



PAINTED METAL


Princess Size

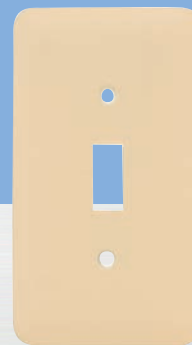

UL Listed unless marked with an asterisk (*)

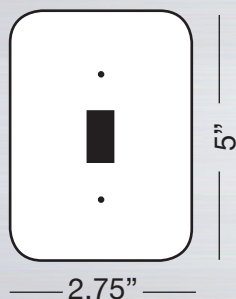


	White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
1-Toggle Switch (1T)	76071	75071	74071	79071	78071	43071	80071
2-Toggle Switch (2T)	76072	75072	74072	79072	78072	43072	80072
3-Toggle Switch (3T)	76073	75073	74073	79073	78073	43073	80073
4-Toggle Switch (4T)	76074	75074	74074	79074	78074		80074
5-Toggle Switch (5T)	76075	75075	74075	79075	78075		80075
6-Toggle Switch (6T)	76076	75076	74076	79076	78076		80076
1-Duplex (10DR)	76101	75101	74101	79101	78101	43101	80101
2-Duplex (20DR)	76102	75102	74102	79102	78102	43102	80102
3-Duplex (30DR)	76103	75103	74103	79103	78103		
4-Duplex (40DR)	76104	75104	74104	79104	78104		
5-Duplex (50DR)	76105	75105	74105	79105	78105		
6-Duplex (60DR)	76106	75106	74106	79106	78106		

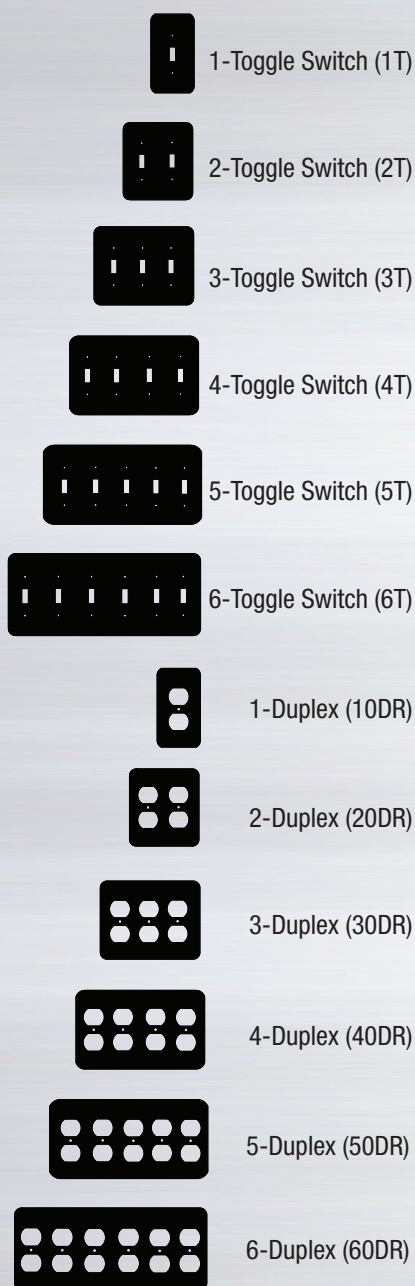

PAINTED METAL

Princess Size

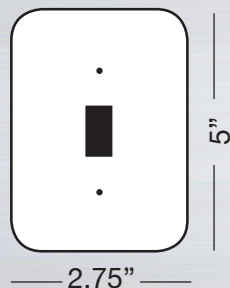


-  1 Single Recept. (1.405") (10R)
-  2 Single Recept. (1.405") (20R)
-  1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)
-  2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)
-  3 Blanks with mounting Straps (Device Mntg. 2.375") (3BDE)
-  1 Blank (Box Mntg. 3.281") (1B)
-  2 Blanks (Box Mntg. 3.281") (2B)
-  3 Blanks (Box Mntg. 3.281") (3B)
-  4 Blanks (Box Mntg. 3.281") (4B)
-  5 Blanks (Box Mntg. 3.281") (5B)
-  6 Blanks (Box Mntg. 3.281") (6B)

White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
76091	75091	74091	79091	78091	43091	80091
76092	75092	74092	79092	78092		
76121	75121	74121	79121	78121		
76122	75122	74122	79122	78122		
76123	75123	74123	79123	78123		
76151	75151	74151	79151	78151	43151	80151
76152	75152	74152	79152	78152	43152	80152
76153	75153	74153	79153	78153		
76154	75154	74154	79154	78154		
76155	75155	74155	79155	78155		
76156	75156	74156	79156	78156		

PAINTED METAL


Princess Size

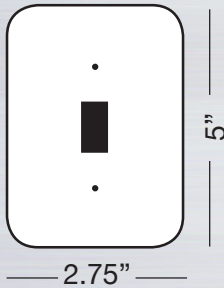

	White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
 Block Duplex/GFI Recept. (SRM)	76401	75401	74401	79401	78401	43401	80401
 2 Block Duplex/GFI Recepts. (2SRM)	76402	75402	74402	79402	78402	43402	80402
 3 Block Duplex/GFI Recepts. (3SRM)	76403	75403	74403	79403	78403	43403	80403
 4 Block Duplex/GFI Recepts. (4SRM)	76404	75404	74404	79404	78404		80404
 5 Block Duplex/GFI Recepts. (5SRM)	76405	75405	74405	79405	78405		80405
 6 Block Duplex/GFI Recepts. (6SRM)	76406	75406	74406	79406	78406		80406
 One 5/8" ID Phone (Box Mntg. 3.281") (01)	76201	75201	74201	79201	78201		80201
 Two 5/8" ID Phones (Box Mntg. 3.281") (02)	76202	75202	74202	79202	78202		
 One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)	76591	75591	74591	79591	78591		
 One .5" with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")	76181	75181	74181	79181	78181		
 One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)	76581	75581	74581	79581	78581		
 One 0.875" ID Hole (Box Mntg. 3.281") (X78)	76480			79480			
 One 20A TL Recept. 1.620" ID Hole (3R)	76111	75111	74111	79111	78111		

PAINTED METAL

Princess Size

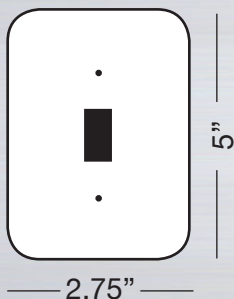


White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
------------------------------	---------------------------	------------------------------	------------------------	---------------------------	----------------------------	----------------------

	Two 20A TL Recepts. 1.620 ID Hole Must Use 3 Gang Plate (23R)	76113	75113	74113	79113	78113	
	One 30A 3 & 4 Wire TL Recept. 1.730 ID Hole (3330R)	76229	75229	74229	79229	78229	
	30/50A Wire Range/Dryer Recept. 2.125 ID Hole (3D)	76221	75221	74221	79221	78221	
	30/50A 3 Wire Range/Dryer Recept. 2.125 ID Hole 2 gang Plate (23D)	76222	75222	74222	79222	78222	
	30/50A 3 Wire Range/Dryer Recept. 2.125 ID Hole (N23D)	76227	75227	74227	79227	78227	
	30/50/60A 4 Wire Recepts. 2.480 ID Hole (5R)	76223	75223	74223	79223	78223	
	30/50A 3 & 4 Wire Range/Dryer Recept. 2.165 ID Hole (5RR)	76224	75224	74224	79224	78224	
	30/50/60A 4 Wire Recepts. with 2.625 ID Hole (L5R)	76225	75225	74225	79225	78225	
	30/50/60A 4 Wire Offset Recepts. 2.275 ID Hole (N5RR)	76226	75226	74226	79226	78226	
	30/50/60A 4 Wire Recepts. 2.255 ID Hole (P5R)	76228	75228	74228	79228	78228	
	Louver, Horizontal (Device Mntg. 2.375) (LH)	76630	75630	74630	79630	78630	
	Louver, Vertical (Device Mntg. 2.375) (LV)	76631	75631	74631	79631	78631	
	2 Louvers, Vertical (Device Mntg. 2.375) (2LV)	76632	75632	74632	79632	78632	

PAINTED METAL


Princess Size

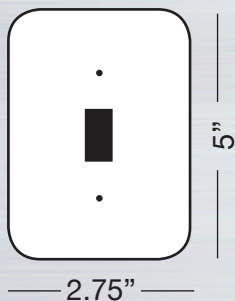

	White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
Interchangeable 1 Hole, Horizontal (71A)	76011X	75011X	74011X	79011X	78011X		
Interchangeable 1 Hole per Gang Horizontal (72A)	76012X	75012X	74012X	79012X	78012X		
Interchangeable 2 Holes, (71B)	76021X	75021X	74021X	79021X	78021X		
Interchangeable 2 Holes per Gang (72B)	76022X	75022X	74022X	79022X	78022X		
Interchangeable 2 Holes per Gang (73B)	76023X	75023X	74023X	79023X	78023X		
Interchangeable 3 Holes, (71C)	76031X	75031X	74031X	79031X	78031X		
Interchangeable 3 Holes per Gang (72C)	76032X	75032X	74032X	79032X	78032X		
Interchangeable 1 Hole, Vertical (71G)	76041X	75041X	74041X	79041X	78041X		
Interchangeable 1 Hole, Horizontal, 2 holes (71A-71B)	76052X	75052X	74052X	79052X	78052X		
Toggle Switch, Interchangeable 2 Holes, (1T-71B)	76062X	75062X	74062X	79062X	78062X		
Toggle Switch, Interchangeable 3 Holes, (1T-71C)	76132X	75132X	74132X	79132X	78132X		
Duplex Recept., Interchangeable 2 Holes, (10DR-71B)	76142X	75142X	74142X	79142X	78142X		
Duplex Recept., Interchangeable 3 Holes, (10DR-71C)	76172X	75172X	74172X	79172X	78172X		

PAINTED METAL

Princess Size

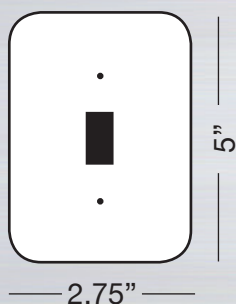


White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
------------------------------	---------------------------	------------------------------	------------------------	---------------------------	----------------------------	----------------------

	Toggle Switch, Duplex Recept. (1T-10DR)	76532	75532	74532	79532	78532	43532	80532
	Toggle Switch, Single Recept. (1.405" ID Hole) (1T-10R)	76512	75512	74512	79512	78512		
	Toggle Switch, 5/8" ID Phone (Box Mntg. 3.281") (1T-01)	76472	75472	74472	79472	78472		
	Toggle Switch, Blank (Box Mntg. 3.281") (1T-1B)	76522	75522	74522	79522	78522		
	Toggle Block Duplex/GFI Recept. (1T-SRM)	76432	75432	74432	79432	78432	43432	
	Duplex Recept., Blank (Box Mntg. 3.281") (10DR-1B)	76542	75542	74542	79542	78542		
	Duplex Recept., 5/8" ID Phone (Box Mntg. 3.281") (10DR-01)	76582	75582	74582	79582	78582		
	Duplex Recept., Single Recept. (1.405" ID Hole) (10DR-10R)	76572	75572	74572	79572	78572		
	Duplex Recept., Block Duplex/GFI Recept. (10DR-SRM)	76672	75672	74672	79672	78672		
	One Blank (Box Mntg. 3.281"), 20A TL Recept. 1.620" ID Hole (1B-3R)	76360			79360			
	Duplex Recept., 20A TL Recept. (1.620" ID Hole) (10DR-3R)	76390	75390	74390	79390	78390		
	Duplex Recept., 30A Range/Dryer Recept. (2.125" ID Hole) (10DR-3D)	76180	75180	74180	79180	78180		
	Single Recept., 20A TL Recept. (1.405" ID Hole) Blank (Box Mntg. 3.281") (10R-1B)	76552	75552	74552	79552	78552		

PAINTED METAL


Princess Size

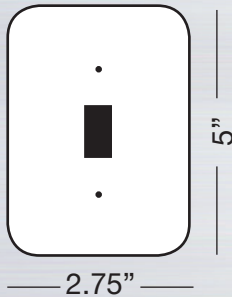

	White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
Single Recept. (1.405" ID Hole) Block Duplex/GFI Recept. (10R-SRM)	76442			79442			
Block Duplex/GFI Recept., Blank (Box Mntg. 3.281") (SRM-1B)	76422	75422	74422	79422	78422		
Toggle Switch, Centered 2 Gang Plate (1T-2G)	76772	75772	74772	79772	78772		
Duplex Recept., Centered 2 Gang Plate (10DR-2G)	76773	75773	74773	79773	78773		
Single Recept., Centered, 2 Gang Plate (1.405" ID Hole) (10R-2G)	76774	75774	74774	79774	78774		
5/8" ID Phone (Box Mntg. 3.281"), Centered 2 Gang Plate (01-2G)	76775	75775	74775	79775	78775		
Block Duplex/GFI Recept. Centered 2-Gang Plate (SRM-2G)	76777			79777			
2 Toggle Switches, Duplex Recept. (2T-10DR)	76543	75543	74543	79543	78543		80543
2 Toggle Switches, Blank (Box Mntg. 3.281") (2T-1B)	76533	75533	74533	79533	78533		
2 Toggle Switches, Block Duplex/GFI Recept. (2T-SRM)	76443	75443	74443	79443	78443	43443	
Toggle Switch, 2 Block Duplex/GFI Recepts. (1T-2SRM)	76453	75453	74453	79453	78453		
Toggle Switch, 2 Blanks (Box Mntg. 3.281") (1T-2B)	76133	75133	74133	79133	78133		
Toggle Switch, 2 Duplex Recepts. (1T-20DR)	76553	75553	74553	79553	78553		

PAINTED METAL

Princess Size

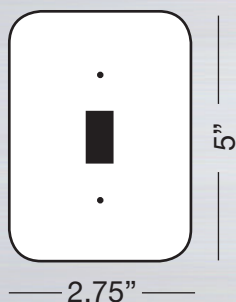


White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
------------------------------	---------------------------	------------------------------	------------------------	---------------------------	----------------------------	----------------------

	Toggle Switch, Block Duplex/GFI Recept., Duplex Recept. (1T-SRM-10DR)	76503	75503	74503	79503	78503	
	Duplex Recept., 2 Blanks (Box Mntg. 3.281") (10DR-2B)	76423	75423	74423	79423	78423	
	Blank (Box Mntg. 3.281"), Duplex Recept., Blank (Box Mntg. 3.281") (1B-10DR-1B)	76193	75193	74193	79193	78193	
	Blank (Box Mntg. 3.281"), 2 Duplex Recepts. (1B-20DR)	76163	75163	74163	79163	78163	
	Single Recept. (1.405" ID Hole) 2 Duplex Recepts. (10R-20DR)	76593	75593	74593	79593	78593	
	Toggle Switch, Blank (Box Mntg. 3.281"), Duplex Recept. (1T-1B-10DR)	76233	75233	74233	79233	78233	
	2 Block Duplex/GFI Recepts., Blank (Box Mntg. 3.281") (2SRM-1B)	76343			79343		
	Block Duplex/GFI Recepts., 2 Blanks (Box Mntg. 3.281") (SRM-2B)	76383			79383		
	2 Duplex Recepts., Block Duplex/GFI Recept. (20DR-SRM)	76673			79673		
	Duplex Recept., 2 Block Duplex/GFI Recepts., (10DR-2SRM)	76683			79683		
	3 Toggle Switches, Duplex Recept. (3T-10DR)	76554	75554	74554	79554	78554	
	3 Toggle Switches, Block Duplex/GFI (3T-SRM)	76454	75454	74454	79454	78454	
	Toggle Switch, 3 Block Duplex/GFI Recepts. (1T-3SRM)	76654			79654		

PAINTED METAL

Princess Size

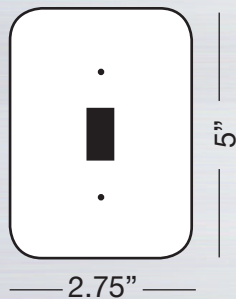

White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
------------------------------	---------------------------	------------------------------	------------------------	---------------------------	----------------------------	----------------------



3 Toggle Switches, Blank
(Box Mntg. 3.281") (3T-1B)

76544

75544

74544

79544

78544



2 Toggle Switches,
2 Duplex Recepts.
(2T-20DR)

76564

75564

74564

79564

78564



2 Toggle Switches, 2 Blanks
(Box Mntg. 3.281") (2T-2B)

76574

75574

74574

79574

78574



Toggle Switch,
3 Duplex Switches
(1T-30DR)

 
76584

75584

74584

79584

78584



2 Duplex Recepts.,
2 Blanks
(Box Mntg. 3.281") (20DR-2B)

76164

75164

74164

79164

78164



3 Block Duplex/GFI
Recepts., Blank
(Box Mntg. 3.281")
(3SRM-1B)

76324

79324



2 Block Duplex/GFI
Recepts., 2 Blanks
(Box Mntg. 3.281")
(2SRM-2B)

76344

79344



Block Duplex/GFI
Recepts., 3 Blanks
(Box Mntg. 3.281")
(SRM-3B)

76384

79384



2 Toggle Switches,
2 Block Duplex/GFI
Recepts. (2T-2SRM)

76664

79664



3 Duplex Recepts.,
Block Duplex/GFI
Recept. (30DR-SRM)

76674

79674



Duplex Recept.,
3 Block Duplex/GFI
Recepts.
(10DR-3SRM)

76684

79684




2 Duplex Recepts.,
2 Block Duplex/GFI
Recepts.
(20DR-2SRM)

76694

79694

PAINTED METAL

Princess Size

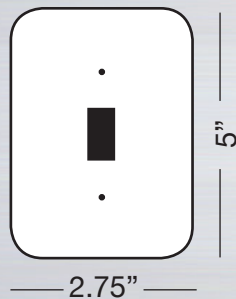

White Semi-Gloss (WA-PRL)	White Wrinkle (DW-PRL)	Ivory Semi-Gloss (IA-PRL)	Ivory Wrinkle (DI-PRL)	Brown Wrinkle (DB-PRL)	Almond Wrinkle (DA-PRL)	Zinc Coat (AUNF-PRL)
------------------------------	---------------------------	------------------------------	------------------------	---------------------------	----------------------------	----------------------



4 Toggle Switches, Duplex Recept. (4T-10DR)



3 Toggle Switches, 2 Block Duplex/GFI Recepts. (3T-2SRM)



4 Toggle Switches, Block Duplex/GFI Recepts. (4T-SRM)



4 Toggle Switches, 1 Blank (Box Mtng. 3.281") (4T-1B)



3 Toggle Switches, 2 Duplex Recepts. (3T-20DR)



 
Toggle Switch, 4 Block Duplex/GFI Recepts. (1T-4SRM)



2 Toggle Switches, 3 Block Duplex/GFI Recept. (2T-3SRM)



5 Toggle Switches, Duplex Recept. (5T-10DR)



4 Toggle Switches, 2 Duplex Recepts. (4T-20DR)



5 Toggle Switches, Block Duplex/GFI Recept. (5T-SRM)



4 Toggle Switches, 2 Block Duplex/GFI Recepts. (4T-2SRM)



Toggle Switch, 5 Block Duplex/GFI Recepts. (1T-5SRM)

76565	75565	74565	79565	78565		
76455			79455			
76465	75465	74465	79465	78465		
76555			79555			
76575	75575	74575	79575	78575		
76655			79655			
76665			79665			
76576	75576	74576	79576	78576		
76196			79196			
76476			79476			
76506			79506			
76656			79656			