

Architectural • Standard

		SATIN ALUMINUM	CLEAR ALUMINUM	POLISHED BRASS	POLISHED STAINLESS	STAINLESS TYPE 302 (.060")	SATIN BRASS (.040")	SATIN BRASS (.060")
	3 Duplex Receptacles (30DR)	62103	95103	64103	68103	70103	94103	96103
	4 Duplex Receptacles (40DR)	62104	95104	64104	68104	70104	94104	96104
	5 Duplex Receptacles (50DR)	62105	95105	64105	68105	70105	94105	96105
	6 Duplex Receptacles (60DR)	62106	95106	64106	68106	70106	94106	96106
	1 Single Recept. (1.405") (10R)	62091	95091	64091	68091	70091	94091	96091
	2 Single Recept. (1.405") (20R)	62092	95092	64092	68092	70092	94092	96092
	3 Single Recept. (1.405") (30R)	62093	95093	64093	68093	70093	94093	96093
	1 Blank with Mounting Strap (Device Mntg. 2.375") (1BDE)	62121	95121	64121	68121	70121	94121	96121
	2 Blanks with Mounting Straps (Device Mntg. 2.375") (2BDE)	62122	95122	64122	68122	70122	94122	96122
	3 Blanks with Mounting Straps (Device Mntg. 2.375") (3BDE)	62123	95123	64123	68123	70123	94123	96123
	1 Blank (Box Mntg. 3.281") (1B)	62151	95151	64151	68151	70151	94151	96151
	2 Blanks (Box Mntg. 3.281") (2B)	62152	95152	64152	68152	70152	94152	96152
	3 Blanks (Box Mntg. 3.281") (3B)	62153	95153	64153	68153	70153	94153	96153
	4 Blanks (Box Mntg. 3.281") (4B)	62154	95154	64154	68154	70154	94154	96154
	5 Blanks (Box Mntg. 3.281") (5B)	62155	95155	64155	68155	70155	94155	96155
	6 Blanks (Box Mntg. 3.281") (6B)	62156	95156	64156	68156	70156	94156	96156
	7 Blanks (Box Mntg. 3.281") (7B)	62157	95157	64157	68157	N/A	94157	N/A
	8 Blanks (Box Mntg. 3.281") (8B)	62158	95158	64158	68158	N/A	94158	N/A

Material Specifications

Stainless Steel		Finish	Shape	Thickness	U.S. Bureau Standards Symbols	Finish Designator	Cat. Page #	
	Type 302 Spec. Grade (18% chrome-8% nickel) Non-Magnetic and Corrosion Resistant For hospitals, schools and other public institutions.	(302SS)	#4 Fine Satin	S	.035	US #32D	93000	A7-13
		(302SS-PRL)	#4 Fine Satin	P	.035	US #32D	53000	A42-47
		(302-6SS)	#4 Fine Satin	S	.060	US #32D	70000	A28-34
		(302SP)	Mirror Polish	S	.035	US #32	68000	A28-34
	Type 430 (SS)		#4 Fine Satin	S	.030	US #32	97000	A7-13
	Type 430 (SS-PRL)		#4 Fine Satin	P	.030	US #32D	57000	A42-47


Aluminum	Clear Anodized (5AA)	Matte, Smooth	S	.050	US #28	95000	A28-34
	Clear Anodized (5AA-PRL)	Matte, Smooth	P	.050	US #28	55000	A42-47
	Bright Satin (SAL)	Satin	S	.040	—	62000	A28-34

Brass & Bronze Lacquered to prevent oxidation	Statuary Bronze Dark (4DBR)	Antiqued, Relieved	S	.040	US #20	69000	A35-41
	Bank Bronze Medium (4ABR)	Antiqued, Relieved	S	.040	US #10B	65000	A35-41
	Satin Brass (4BB)	Satin #4 Polish	S	.040	US #4	94000	A28-34
	Satin Brass (4BB-PRL)	Satin #4 Polish	P	.040	US#4	54000	A42-47
	Satin Brass (6BB)	Satin #4 Polish	S	.060	US #4	96000	A28-34
	Satin Bronze (4SBR)	Satin #4 Polish	S	.040	US #10	66000	A35-41
	Satin Bronze (4SBR-PRL)	Satin #4 Polish	P	.040	US #10	56000	A42-47
	Polished Brass (4PB)	Mirror Finish	S	.040	US #3	64000	A28-34


Lexan® Thermoplastic	Brown	91000	A54-57
	Gray	77000G	A54-57
	Ivory	92000	A54-57
	Red	77000R	A54-57
	White	90000	A54-57

WALL PLATE COLOR GUIDE


STANDARD SHAPE

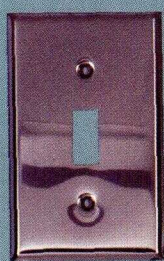


A

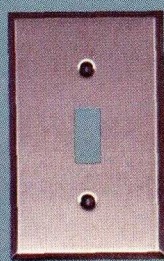


B

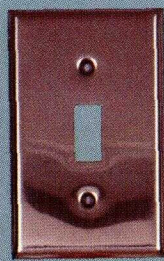


C

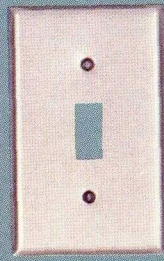

D

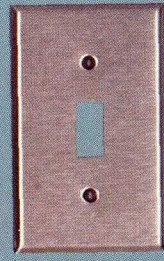


E

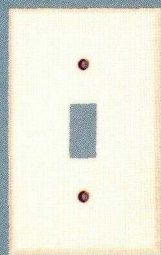


F




G

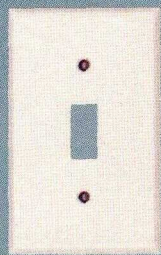


H

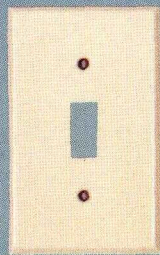


I

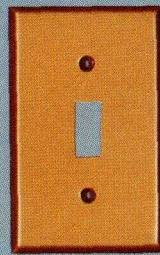


J

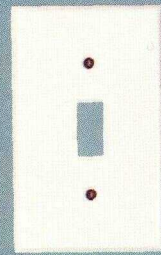

K

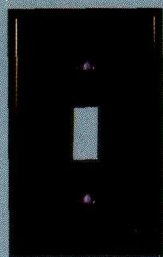


L

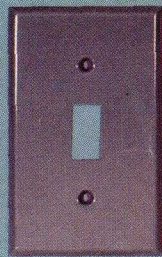

M




N

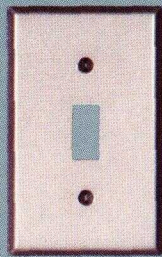


O




P

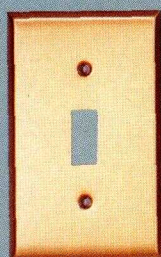


Q

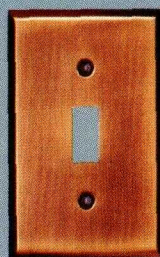


R

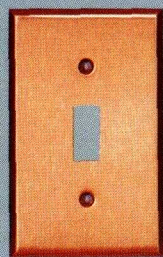

S

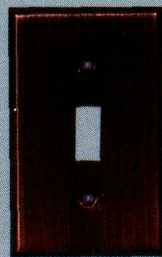

T

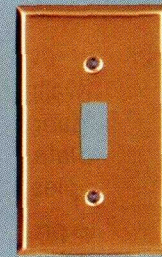

U

A. Polished Chrome (83000)
B. Stainless Steel (97000, 93000, 70000)
C. Polished Stainless (68000)
D. Clear Anodized Aluminum (95000)
E. Satin Aluminum (62000)
F. Ivory Wrinkle (99000)

G. Brown Wrinkle (98000)
H. White Wrinkle (85000)
I. Ivory Semi-Gloss (84000)
J. Sprayed Brass Matte (81000)
K. White Semi-Gloss (86000)
L. Brown Semi-Gloss (82000)
M. Gray Semi-Gloss (58000)

N. Red Semi-Gloss (51000)
O. Aluminum Painted Steel/Cadilite (88000)
P. Black Matte (87000)
Q. Satin Brass (94000, 96000)
R. Bank Bronze (65000)
S. Satin Bronze (66000)
T. Statuary Bronze (69000)
U. Polished Brass (64000)