

CONDUIT CAPPED BUSHINGS

FOR THREADED RIGID CONDUIT AND IMC


FEATURES

- Bushings are supplied with metal cap insert.

STANDARD MATERIALS

Zinc Die Cast

Zinc Die Cast - Metal Capped

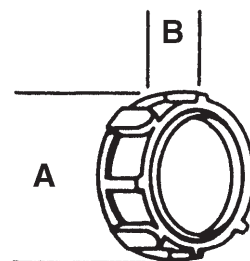

TYPE 820Z

CATALOG NUMBER	TRADE SIZE	DIM A	DIM B	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
820Z	1/2"	1.15	0.47	100	1000	2	18202
821Z	3/4"	1.41	0.47	100	1000	4	18212
822Z	1"	1.68	0.54	50	500	6	18222
823Z	1-1/4"	1.94	0.60	25	250	9	18232
824Z	1-1/2"	2.20	0.62	25	250	13	18241
825Z	2"	2.80	0.62	-	25	17	18252
838Z	2-1/2"	3.32	0.93	-	25	35	18382
839Z	3"	3.94	0.93	10	100	48	18392
840Z	3-1/2"	4.45	0.94	5	25	57	18402
841Z	4"	5.00	0.97	5	25	81	18412

Also available Zinc Die Cast bushing with paper cap. Please call factory.

CONDUIT METAL PENNIES

FOR THREADED RIGID CONDUIT AND IMC

APPLICATION

Used to insert into zinc die cast or malleable iron bushing.

STANDARD MATERIALS

Steel

Metal Pennies



TYPE 535M

CATALOG NUMBER	TRADE SIZE	UNIT PACK	MASTER PACK	LBS. / 100 PCS.	UPC #
530M	1/2"	-	500	1	15301
531M	3/4"	-	500	1	15311
532M	1"	-	100	1	15321
533M	1-1/4"	-	100	2	15331
534M	1-1/2"	-	100	2	15341
535M	2"	-	50	3	15351
536M	2-1/2"	-	50	5	15361
537M	3"	-	50	6	15371
538M	3-1/2"	-	25	10	15381
539M	4"	-	25	12	15391
559M	5"	-	10	13	15591
569M	6"	-	10	15	15691