

# TAPES FOR THE ELECTRICAL INDUSTRY

**Shurtape®**

**TRUE TO YOUR WORK®**






**ELECTRICAL WORK DEMANDS DURABILITY, RELIABILITY AND SUPERIOR RESULTS. THAT'S WHY SO MANY CHOOSE TOOLS THAT ARE BUILT FOR STRENGTH AND DURABILITY – AND THAT INCLUDES THE TAPES USED FOR ELECTRICAL AND MECHANICAL PROTECTION APPLICATIONS.**



**THAT'S WHY SHURTAPE, A COMPANY THAT'S BEEN DEDICATED TO CRAFTING HIGH PERFORMING AND INNOVATIVE TAPE SOLUTIONS SINCE 1955, IS EXPANDING ITS BUILDING AND CONSTRUCTION PORTFOLIO WITH A NEW LINE OF ELECTRICAL TAPES. WHETHER USED FOR PRIMARY INSULATION, AS A JACKETING OR FOR PHASING, THESE TAPES ARE ENGINEERED TO MEET – AND EXCEED – THE INDUSTRY'S EXPECTATIONS FOR QUALITY AND PERFORMANCE. SO YOU CAN BE CONFIDENT EVERY JOB, BIG OR SMALL, IS DONE RIGHT THE FIRST TIME.**

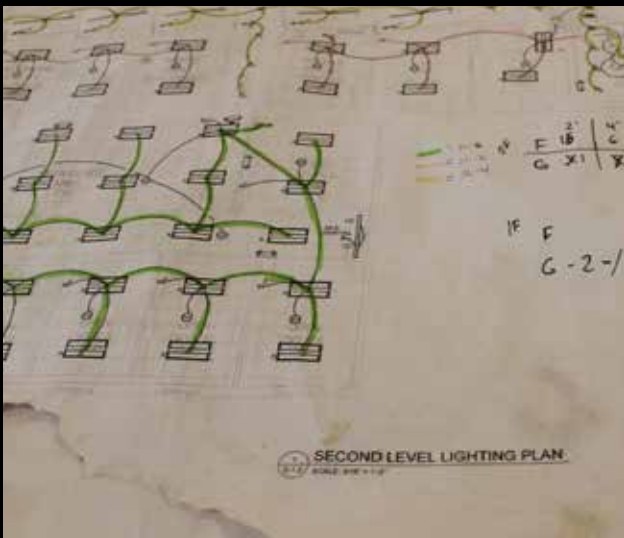



# PRODUCT PORTFOLIO

## LR 117B



30 mil, all-weather linerless rubber tape that is compatible with all extruded dielectric cable insulations, is rated for insulating splices and terminations in wires and cables up to 69,000 V, and has an emergency overload capacity of 130 C. High voltage LR 117 is a self-bonding, highly conformable and UV-resistant electrical tape that delivers high stretch capabilities to form void-free moisture seals when creating splices.

## EV 97B



Premium grade, 8.5 mil, all-weather vinyl tape used for insulating electrical splices up to 600 V, as a jacketing on high voltage splices and repairs, and can also be used when wrapping wire harnesses and cables. EV 97B is UL Listed, CSA Approved, lead free and flame retardant, and is a highly conformable tape that delivers a moisture-tight seal in temperatures ranging from 0 F to 220 F.

## EV 77B



Professional grade, 7.0 mil, all-weather vinyl insulating tape used for electrical and mechanical protection in temperatures ranging from 0 F to 220 F. UL Listed and CSA Approved, EV 77 electrical tape is lead free, flame retardant, and is highly conformable to deliver a moisture-tight seal, even in extreme temperatures.

## EV 77C



Professional grade, 7.0 mil, all-weather vinyl tape used for color-coding and phase identification in electrical applications in temperatures ranging from 0 F to 220 F. UL Listed and CSA Approved, EV 77C colored electrical tape is lead free, flame retardant, and is highly conformable to deliver a moisture-tight seal, even in extreme temperatures.

## EV 57B



General purpose grade, 7.0 mil vinyl insulation tape for use in a variety of mechanical and electrical applications. UL Listed and CSA Approved, EV 57 is a highly conformable, lead free and flame retardant electrical tape for use indoors and out.

## EV 57C



General purpose grade, 7.0 mil vinyl insulating tape for use in a variety of mechanical and electrical applications, including color-coding and phasing tasks. EV 57C is UL Listed and CSA Approved, and is a highly conformable, lead free and flame retardant colored electrical tape for use indoors and out.

## PC 6



Economy grade cloth duct tape for gooseneck, non-critical and general use applications, including sealing, wrapping, binding and bundling. PC 6 is a 6.0 mil duct tape that offers good conformability and easy handling to prevent it from twisting or curling during application.

## PC 9



Contractor grade cloth duct tape featuring aggressive adhesive and cold temperature performance for sealing, seaming, repairing, holding and waterproofing applications, as well as for tasks in the restoration industry, such as holding poly-sheeting. A co-extruded, repair duct tape, 9.0 mil PC 9 provides superior adhesion with quick stick; excellent holding power for indoor and outdoor use; and easy tearability to finish jobs with speed and ease.

## PW 100



General purpose grade, 10.0 mil PVC tape for use on under and above ground pipe installations. PW 100 pipe wrap tape offers excellent moisture resistance and conformability to protect metal and plastic piping.

## PW 200



General purpose grade, 20.0 mil PVC tape for use on under and above ground pipe installations. PW 200 pipe wrap tape offers excellent moisture resistance and conformability to protect metal and plastic piping.

## FT 175



General purpose friction tape for insulating and wrapping electrical splices and connections. FT 175 is a cotton cloth grip tape offering excellent adhesion, exceptional tensile strength and good abrasion resistance for a range of electrical and mechanical jobs.

## BT 100



Non-adhesive barricade tape for marking restricted areas and managing access to work sites by professionals in the safety, construction, utilities, hardware and other industries. BT 100 features 2-inch letters that are easy to read, is resistant to moisture and humidity and resists sagging for long-term use, even when stretched over long distances.



# SHURTAPE TAPES FOR THE ELECTRICAL

Shurtape SKU	Item Description	Thickness	Size	Color	Rolls per Case
<b>EV 77 Professional Grade Electrical Tapes</b>					
104706	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Black	100
104705	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Brown	100
104704	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Yellow	100
104703	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Orange	100
104702	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Blue	100
104701	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Green	100
104700	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Red	100
104817	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Gray	100
104699	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Violet	100
104698	Professional Grade Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	White	100
104838	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Black	100
104839	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Brown	100
104840	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Yellow	100
104841	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Orange	100
104842	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Blue	100
104843	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Green	100
104844	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Red	100
104845	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Gray	100
104846	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Violet	100
104847	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	White	100
152530	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Black	10
152531	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Brown	10
152532	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Yellow	10
152533	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Orange	10
152534	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Blue	10
152535	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Green	10
152536	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Red	10
152537	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Gray	10
152538	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	Violet	10
152539	Professional Grade Electrical Tape; 600 Volt; Corrugated Tower	7 mil	3/4in x 66ft	White	10
<b>EV 97 Premium Grade Electrical Tape</b>					
104697	Premium Grade Electrical Tape; 600 Volt	8.5 mil	3/4in x 66ft	Black	100
<b>LR 117 Linerless Rubber Electrical Tapes</b>					
104730	Premium Grade Linerless Splicing Tape; Ethylene Propylene Rubber	30 mil	3/4in x 30ft	Black	60
152549	Premium Grade Linerless Splicing Tape; Ethylene Propylene Rubber	30 mil	1in x 30ft	Black	42
152550	Premium Grade Linerless Splicing Tape; Ethylene Propylene Rubber	30 mil	1 1/2in x 30ft	Black	30
152551	Premium Grade Linerless Splicing Tape; Ethylene Propylene Rubber	30 mil	2in x 30ft	Black	24
<b>FT 175 Friction Tape</b>					
104962	General Purpose Grade Cotton Cloth Grip Tape	12 mil	3/4in x 60ft	Black	50



# CHANNEL


Shurtape SKU	Item Description	Thickness	Size	Color	Rolls per Case
EV 57 General Purpose Grade Electrical Tapes					
104808	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 60ft	Black	100
200782	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Black	100
200783	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	White	100
200784	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Red	100
200785	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Green	100
200786	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Blue	100
200787	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Orange	100
200788	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Yellow	100
200789	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Brown	100
104816	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Gray	100
187742	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Violet	100
152564	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Black	20
152554	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Black	20
152555	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	White	20
152556	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Red	20
152557	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Green	20
152558	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Blue	20
152559	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Orange	20
152560	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Yellow	20
152561	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Brown	20
152562	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Gray	20
152563	General Purpose Vinyl Electrical Tape; 600 Volt	7 mil	3/4in x 66ft	Violet	20
PW 100 10 mil PVC Pipe Wrap Tapes					
104779	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	2in x 33.3yd	Printed	24
104776	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	3in x 33.3yd	Printed	16
104777	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	4in x 33.3yd	Printed	12
104778	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	6in x 33.3yd	Printed	8
104928	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	2in x 33.3yd	Black	24
104929	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	3in x 33.3yd	Black	16
104930	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	4in x 33.3yd	Black	12
104931	Corrosion-Resistant PVC Pipe Wrap Tape	10 mil	6in x 33.3yd	Black	8
PW 200 20 mil PVC Pipe Wrap Tape					
104903	Corrosion-Resistant PVC Pipe Wrap Tape	20 mil	2in x 33.3yd	Black	16
PC 6 Economy Grade Duct Tape					
120954	Economy Grade, Co-Extruded Cloth Duct Tape	6 mil	48mm x 55m	Silver	24
PC 9 Contractor Grade Duct Tapes					
152322	Contractor Grade, Co-Extruded Cloth Duct Tape	9 mil	48mm x 55m	Black	24
152374	Contractor Grade, Co-Extruded Cloth Duct Tape	9 mil	48mm x 55m	Red	24
152305	Contractor Grade, Co-Extruded Cloth Duct Tape	9 mil	48mm x 55m	Silver	24
BT 100 Non-Adhesive Barricade Tapes					
232531	Non-Adhesive Barricade/Marking Tape; CAUTION	2-3 mil	3in x 1000ft	Yellow	16
232532	Non-Adhesive Barricade/Marking Tape; DANGER	2-3 mil	3in x 1000ft	Red	16



# PERFORMANCE RIGHT DOWN TO THE WIRE

Feel the Quality. Trust the Performance. Shurtape electrical tapes are engineered with the physical attributes demanded to perform at or above the industry standard to deliver superior results with each and every use.

## TENSILE

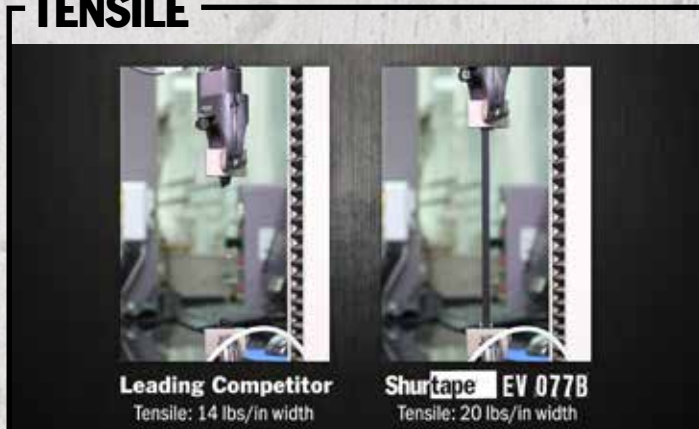

### WHY IT MATTERS:

The greater your tape's tensile strength, the more you can stretch it and not have it break. In certain electrical taping applications, wrapping tightly is critical.

## STRETCH



### WHY IT MATTERS:

A tape with high stretch properties, combined with high tensile strength, allows you, the contractor, to wrap splices extremely tightly and efficiently. This ensures a tight seal around any splice.

## RESIDUE



### WHY IT MATTERS:

No one likes dealing with sticky electrical tape residue, especially in extreme weather conditions. Or on temporary jobs, such as phasing, where residue can not only make your wire and tape much more difficult to work with, but can also mar your customer's work surfaces. Shurtape electrical tapes are designed with a specific adhesive formula and quantity so as not to gum up the job like other leading tapes.

## ADHESION/EDGE TACK



### WHY IT MATTERS:

If the adhesion to backing is too great, the tape can be harder to get off the roll. Shurtape electrical tapes are designed with a level of adhesion to backing that makes them easy and smooth to get off the roll.

**Shurtape®**  
TRUE TO YOUR WORK®

SHURTAPE.COM  
1.888.442.TAPE



All trademarks are registered trademarks owned by Shurtape Technologies, LLC, unless otherwise noted.

ISO 9001 CERTIFIED QUALITY SYSTEM © 2018 Shurtape Technologies, LLC  
Printed in USA on recycled paper. Form Electrical Tapes-03/12/2018 To reorder, please contact  
Sherry Stone (sstone@shurtape.com) or 828.267.8234