


R4 Series

4" LED Recessed Downlight Trims

Trimmed Options

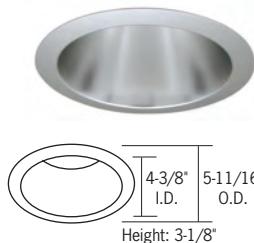

Specification Grade Specular Reflector

Specification grade specular reflector: narrow beam clear, medium beam clear, wide beam clear, platinum, platinum wheat, or white. OD: 5-11/16"; ID: 4-3/8"

Add "C" (clear lens) or "SL" (sandblast lens) after finish code for wet location approved trim.

- C4322N-CLR*** - Narrow Beam (36°), Clear Reflector
- C4322M-CLR*** - Medium Beam (54°), Clear Reflector
- C4322W-CLR*** - Wide Beam (80°), Clear Reflector
- C4322-PL*** - Platinum Reflector (57°)
- C4322-PLWHE** - Platinum Wheat Reflector (57°)
- C4322-WHT** - White Reflector (69°)

*Available with White Painted Flange, add "-WPF" to part number



Two Piece Reflector Trim with Lens

Two piece reflector with lens: Clear or white upper reflector, clear or platinum lower cone; regressed prismatic convex lens, Wet Location Listed. OD: 5-11/16"; ID: 3-7/8"


- C4327-CLR-(CLR,PL)** - Clear Reflector/ Clear or Platinum Lower Cone
- C4327-WHT-(CLR,PL)** - White Reflector/ Clear or Platinum Lower Cone



Two Piece Reflector/Baffle Trim with Lens

Two piece reflector with lens: Clear or white upper reflector, black or white lower baffle with regressed prismatic convex glass lens; 1-1/2" Regress. Wet Location Listed. OD: 5-11/16"; ID: 3-7/8"

- C4327-CLR-(B,P)** - Clear Reflector/ Black or White Lower Baffle
- C4327-WHT-(B,P)** - White Reflector/ Black or White Lower Baffle

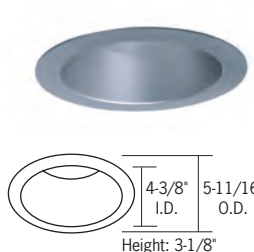

ISOWET Dead Front Reflector Trim

Isolated, wet location approved thermoplastic reflector with clear glass lens. Lens is deeply regressed inside top of reflector. OD: 5-11/16"; ID 4-3/8"

- C4322DF-SL** - Satin Silver Paint
- C4322DF-SL-WPF** - Satin Silver Paint with White Painted Flange
- C4322DF-WHT** - Matte White Paint



Lensed Wall Wash Trim

Lensed Wall Wash Trim; Clear, Platinum or White Reflector. OD: 5-11/16"; ID: 4"

- C4323-CLR*** - Clear Reflector
- C4323-PL*** - Platinum Reflector
- C4323-WHT** - White Reflector

*Available with White Painted Flange, add "-WPF" to part number




Two Piece Reflector Trim

Two piece reflector: clear or white upper reflector, clear or platinum lower cone; Includes (1) LF20-CL glass lens. OD: 5-11/16"; ID: 3-7/8"

Approved for dry/damp locations. Approved for wet locations when glass lens is installed.


- C4321-CLR-(CLR,PL)** - Clear Reflector/Clear or Platinum Lower Cone
- C4321-WHT-(CLR,PL)** - White Reflector/Clear or Platinum Lower Cone

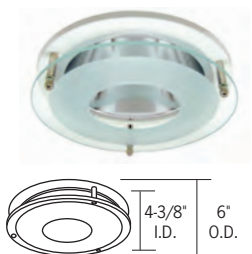

Floating Glass Ring

Floating glass ring; clear or white reflector. 1-1/4" Drop from ceiling; 3-1/2" center hole. Glass OD: 6".

CTR4326L-(CLR,WHT)-P

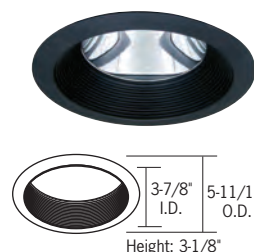


Two Piece Reflector/Baffle Trim

Two piece reflector: clear or white upper reflector, black or white lower baffle; Includes (1) LF20-CL glass lens. OD: 5-11/16"; ID: 3-7/8"

Approved for dry/damp locations. Approved for wet locations when glass lens is installed.

- C4321-CLR-(B,P)** - Clear Reflector/ Black or White Lower Baffle
- C4321-WHT-(B,P)** - White Reflector/ Black or White Lower Baffle

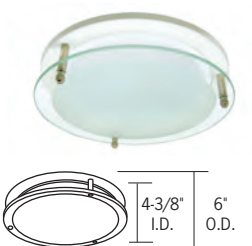

Floating Glass Trim

Floating glass disc; clear or white reflector. 1-1/4" Drop from ceiling. Glass OD: 6".

CTR4325L-(CLR,WHT)-P

R4 Series

4" LED Recessed Downlight Trims

Trimless Options

Important Notes: Trimless option requires use of accessory mud frame (**MF4** – ordered separately).
Trimless option CANNOT be used on Remodel (R4RM) style housings.
Trimless option for use with 1/2" - 1" ceiling thicknesses only.



Specification Grade Specular Reflector

Specification grade reflector: narrow beam clear, medium beam clear, wide beam clear, platinum, or white. ID: 4-3/8"

Add "C" (clear lens) or "SL" (sandblast lens) after finish code for wet location approved trim.



- CN4322N-CLR** - Narrow Beam (36°), Clear Reflector
- CN4322M-CLR** - Medium Beam (54°), Clear Reflector
- CN4322W-CLR** - Wide Beam (80°), Clear Reflector
- CN4322-PL** - Platinum Reflector (57°)
- CN4322-WHT** - White Reflector (69°)



Mud Frame

Required for use with Trimless trim option. Die-cast ring with steel mesh frame – painted white. OD: 10"

MF4 - 4" Mud Frame

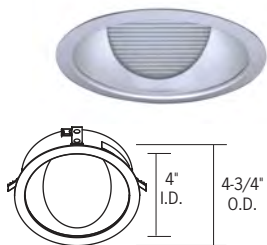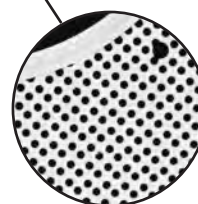

Lensed Wall Wash Trim

Lensed Wall Wash Trim; Clear, Platinum or White Reflector. ID: 4"

- CN4323-CLR** - Clear Reflector
- CN4323-PL** - Platinum Reflector
- CN4323-WHT** - White Reflector