



2016 Product Guide

IRRIGATION

King Innovation got its start in Irrigation with the King Drain (1989) and has since grown in the market through a commitment to outstanding quality. The Black Series Waterproof Connectors (1990) have been a constant in the industry, and the DryConn brand has expanded to incorporate a variety of waterproof connector styles. To fully round out the Irrigation offering, King has added several brands including SnapTap Saddles (2001), Siphon King Hand Pumps (2007) and the I-tool Irrigation Multi-Tool (2013).

ELECTRICAL

We at King Innovation are committed to safety. Electricians nationwide use DryConn Aqua Series Waterproof Connectors (1990) to ensure safe, waterproof connections, and use the AlumiConn Aluminum to Copper Lug (2006) to protect homes and commercial buildings from the dangers of aluminum wiring. Gorilla Nuts (2009) expand our Electrical offering, while maintaining our commitment to safe and quality wire connections.

GAS UTILITY

King Innovation's interest in the gas utility market was spiked when we realized contractors needed a better solution for waterproofing underground tracer wire splices. Our DryConn Direct Bury Lug Yellow (2003) ensures safe, waterproof and corrosion proof underground connections without having to cut the main line.

CATHODIC




At King Innovation, protecting splices from harsh outdoor elements like water, temperature and corrosion is what we do best. In the cathodic market, we saw a need for an anode splice box to do just that, and our engineers developed the DryConn Visilock with SmartGel (2007) to meet this industry's requirements.

WATER UTILITY

King Innovation's interest in the water utility market was spiked when we realized contractors needed a better solution for waterproofing underground tracer wire splices. Our DryConn Direct Bury Lug Aqua (2008) ensures safe, waterproof and corrosion proof underground connections without having to cut the main line.

LIGHTING

Contractors in the irrigation industry have been using DryConn Waterproof Wire Connectors for years in landscape lighting applications. We have made a commitment to serving customers in this industry with the development of the innovative L-tool Lighting Multi-Tool (2015), and with our offering of BlissLights Perma Bright Laser Light Fixtures (2015).

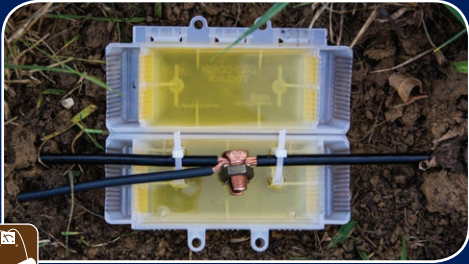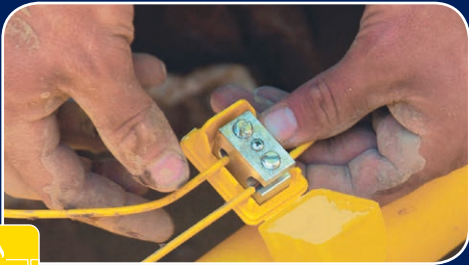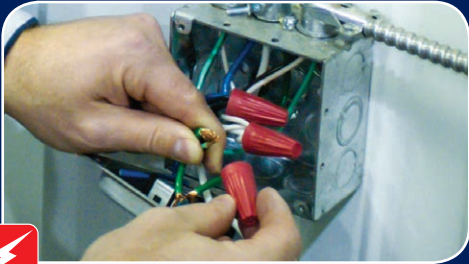

DRYCONN® WATERPROOF CONNECTORS

Black Series	5
DBT-600 & DBR/Y-600	5
DBYN-600 & DBO/B-600	5
CPC-C and CPC-L	6
DBR/Y-600 Black	6
DBSR Black Medium.....	6
Dry-Crimp.....	6
KSC (King Shrink Crimp)	7
DB Power Connect	9
316 IR+	9
HSC (Heat Shrink Crimp)	9
Low Voltage.....	10
GTSR (Grease Tube w/Strain Relief)	10
Aqua Series.....	11
Direct Bury	12
VisiLock® w/SmartGel®	16
King 6 Yellow, Blue	17
DBSR Yellow, Aqua	17
DB Lug Yellow, Aqua	17
Split Bolt Housing Yellow, Aqua	17
ACE CONNECTORS™	7
BLISS LIGHTS	8
CONTRACTORS' CHOICE®	13
GORILLA NUTS®	14
ALUMICONN®	15
SIPHON KING®	
Siphon King Utility Pumps	18
Siphon King Gas Powered Pump	19
Siphon King Replacement Parts	19
SNAPTAP® SADDLES	20
KING DRAINS®	21
SAPLING SOAKER™	22
BALL BEARING PROBE	22
LEAK-B-GONE™ PVC LEAK STOPPER RING	23
KING GRIPS® & REPLACEMENT PARTS	23
MESH GRIPS	23
TOOLS	24-25
ACCESSORIES	26-28
MERCHANDISING ITEMS	29-32
ENGINEERING HOTLINE	32
CORE VALUES	33
WIRE COMBINATIONS	34-35

ICON LEGEND



Irrigation



Landscape Lighting



Direct Bury



Golf



Electrical



Gas Utility



Cathodic Protection



Water & Sewer



Lighting



For use with all applications listed above

CONTACT

42 N. Central Drive
O'Fallon, MO 63366

Phone: 800.633.0232

Fax: 636.519.5410

Engineering Hotline:
877.771.8885

Email:
customerservice
@kinginnovation.com

Websites:
www.kinginnovation.com



ORDER BY 3:00 CST AND YOUR PRODUCT
WILL BE OUT THE DOOR THAT DAY!



UL 486D SAFETY

The UL 486D Listing is a standard of safety, a mark that guarantees reliable long-term waterproof connections. In fact, for wire connectors, it is the most difficult standard to meet. At King Innovation we maintain a research/development lab and manufacturing facility on-site in O'Fallon, MO to allow for rigorous testing and ongoing quality checks.

Why is UL so important to you?

Liability

Using a connector that does not meet the strict UL standard of quality means a huge liability risk. This risk is virtually eliminated with a UL 486D Listed splice.

Quality

When working with electricity, an unreliable connector is just not an option. A UL listing means safe splices... which means safe irrigation, lighting and electrical systems.

Compliance

A UL 486D connector ensures that you and your customers are in constant compliance with national and local electrical codes in wet, damp and direct bury applications.

What does King do to ensure quality?

Testing

The thorough DryConn testing process ensures that these connectors can withstand 2,200 Vac while submerged, are heat aged up to 90°C, and can endure cold down to -18°C... and that's just the beginning.

Manufacturing

A controlled manufacturing process plus the use of superior materials allows DryConn connectors to meet stringent quality requirements. All processes take place in O'Fallon, MO for full visibility and regulation.

3rd Party Audits

Each quarter King is visited by a UL auditor who reviews the manufacturing processes to ensure our quality connector "recipe" is intact.

Never assume all connectors are created equally- that couldn't be farther from the truth. Do your research. For a guaranteed safe connection, count on DryConn.

For additional product safety information,
call our Engineering Hotline at

(877) 771-8885



Black Series

The Original Black Connector*

- UL 486D Listed and 600V rated
- Impact resistant
- #1 in the industry
- Waterproof and corrosion proof
- One-step® installation saves time and money
- No pre-twisting required
- For use in Irrigation, Landscape Lighting and Direct Bury applications
- Pre-filled with dielectric silicone sealant that never hardens

SKU# 61135 Black/White- Bag of 25
 SKU# 61145 Black/White- Bag of 100
 SKU# 61146 Black/White- Canister of 150
 SKU# 61148 Black/White- Canister of 500
 SKU# 61235 Black/Gray- Bag of 20
 SKU# 61241 Black/Gray- Canister of 100
 SKU# 61242 Black/Gray- Canister of 500
 SKU# 61245 Black/Gray- Bag of 100
 SKU# 61335 Black/Blue- Bag of 10
 SKU# 61345 Black/Blue- Bag of 50
 SKU# 61350 Black/Blue- Canister of 50
 SKU# 61435 Black/Green- Bag of 20
 SKU# 61441 Black/Green- Canister of 100

Black/Green
Min #22/Max #8

**PERFECT
FOR LED
APPLICATIONS!**

Black/White
Min #22/Max #12

Black/Gray
Min #22/Max #8



Black/Blue
Min #14/Max #6



All products available in bags



All products available in canisters



MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

***THE COLOR BLACK IS A TRADEMARK OF KING INNOVATION**



Min #22/Max #8

DBT-600 (Tube w/Tan Wing) and DBR/Y-600

(Tube w/Red/Yellow Gorilla Nut)

Direct Bury Silicone Filled Tube w/Strain Relief

- UL 486D Listed and 600V rated
- Waterproof and corrosion proof
- Snap fit lid provides strain relief
- UV and impact resistant
- Pre-filled with silicone that never hardens
- Perfect for Two-Wire Decoder Systems

SKU# 20220 DBT-600- Bag of 2
 SKU# 20225 DBT-600- Box of 100
 SKU# 20230 DBR/Y-600- Bag of 2
 SKU# 20235 DBR/Y-600- Box of 100



Min #22/Max #12

Min #22/Max #8

DBYN-600 (Tube w/Yellow Nut) and DBO/B-600

(Tube w/Orange/Blue Gorilla Nut)

Direct Bury Silicone Filled Tube w/Strain Relief

- Perfect for use in two-wire decoder systems and direct bury applications
- UL 486D Listed for waterproof and direct bury connections
- Max 600V
- UV resistant for above ground applications
- Pre-filled with dielectric silicone sealant that never hardens
- Snap fit lid provides strain relief

SKU# 20520 DBYN-600- Bag of 2
 SKU# 20525 DBYN-600- Box of 100
 SKU# 20630 DBO/B-600- Bag of 2
 SKU# 20635 DBO/B-600- Box of 100



MADE IN USA OF US AND FOREIGN PARTS

U.S. Pat. 8,431,824 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

IRRIGATION

DRYCONN® WATERPROOF CONNECTORS

CPC (Central Point Connector)

- Excellent for making central point connections in low voltage landscape lighting applications
- Waterproof and corrosion proof
- Strain resistant tube is pre-filled with dielectric silicone sealant that never hardens
- Secure mechanical connection
- Max 50 Volts
- Manufacturer approved for direct bury
- UV and impact resistant
- Blends into landscape, even when not buried

SKU# 20810 CPC-C (with Crimps)- Box of 25

SKU# 20815 CPC-L (with Lugs)- Box of 25

CPC-L (with Lug)
Min #18/Max #10

CPC-C (with Crimps)
Min #18/Max #10



MADE IN USA OF US AND FOREIGN PARTS

DRYCONN® WATERPROOF CONNECTORS

DBR/Y-600 Black (Tube w/Red/Yellow Gorilla Nut)

Direct Bury Silicone Filled Tube w/Strain Relief

- UL 486D Listed and 600V rated
- Waterproof and corrosion proof
- Snap fit lid provides strain relief
- UV and impact resistant
- Pre-filled with silicone that never hardens

SKU# 20250 DBR/Y-600 Black- Bag of 2

SKU# 20255 DBR/Y-600 Black- Box of 100



Min #22/Max #8



MADE IN USA OF US AND FOREIGN PARTS

DRYCONN® WATERPROOF CONNECTORS

DBSR® Black Medium Direct Bury Twist-on w/Strain Relief

- UL 486D Listed and 600V rated
- Waterproof and corrosion proof
- Pre-filled with dielectric silicone sealant that never hardens
- Easy latch lid provides strain relief
- Perfect for direct bury, low voltage lighting and irrigation systems

SKU# 63415 DBSR Black Medium- Canister of 15

SKU# 63475 DBSR Black Medium- Box of 100



Min #22/Max #6



MADE IN USA

U.S. Pat. 7,170,005, 5,771,578, 6,815,616, 7,122,742 and additional Patents Pending apply.
All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

DRYCONN® WATERPROOF CONNECTORS

Dry-Crimp Connectors

- Crimp style wire connector
- Copper crimp with protective housing
- For use in low voltage lighting applications
- Allows installer to test connection prior to waterproofing splice
- Two crimp sizes available to cover a wire range from #18 - #10 AWG

SKU# 20240 Dry-Crimp Non-Filled Connectors- Bag of 25 Splices

(contents include 25 non-filled housings, 25 small and 25 large copper crimps)

SKU# 20245 Dry-Crimp Filled Connectors- Bag of 25 Splices

(contents include 25 pre-filled housings, 25 small and 25 large copper crimps)

SKU# 20248 Silicone Sealant- 1- 5.3oz Tube

SKU# 20249 Replacement Crimp Sleeves- Bag of 25

(contents include 25 small and 25 large copper crimps)

Pre-Filled



Non-Filled
Silicone sealant sold separately



MADE IN USA OF US AND FOREIGN PARTS

KING INNOVATION'S LANDSCAPE LIGHTING CONNECTOR SYSTEM

Together, the KSC Waterproof Wire Connectors (King Shrink Crimp), King Krimper tool and the Mini-Torch make for a complete landscape lighting wire connection system.

STEP 1: PICK YOUR SIZE

NEED: KSC WIRE CONNECTORS (KING SHRINK CRIMP)

Use one of the four connector sizes available for secure, mechanical splices. The in-line splice method allows for unobtrusive connections along docks, decks or trees as well as direct bury applications.

- For use in low voltage lighting applications
- Crimp style connector with waterproof heat shrink
- Manufacturer approved for direct bury
- Four sizes available for applications from Min #18 to Max #8

DRYCONN®
WATERPROOF CONNECTORS



Visit www.kinginnovation.com/ksc-king-shrink-crimp-connectors for a complete list of KSC wire combinations

STEP 2: MAKE A CONNECTION

NEED: KING KRIMPER TOOL

The King Krimper Tool is a ratcheting, non-retractable tool specifically designed for use with KSC Connectors. Pre-defined compression channels ensure a solid splice. In addition, color coding means you never have to guess which compression channel to use with your connector.

- For use with KSC (King Shrink Crimp) connectors
- Ratcheting style tool
- Pre-defined compression for each connector size guarantees a secure connection
- Durable tool for extended use



STEP 3: WATERPROOF

NEED: MINI-TORCH

It's all about the GOO! KSC Connectors come with an adhesive lined heat shrink that slides over the top of a splice. Once heated (using the Mini-Torch), the sealant melts to completely cover the connection, keeping it safe from water, corrosion, and any harsh outdoor elements.

- Perfect for use with heat shrink style wire connectors
- Uses butane gas (not included)
- Quick light torch with easily adjustable continuous flame
- Compact size for portability
- Includes soldering attachment



SKU# 72010 KSC-1 #14 - #18 AWG (Extra Small)- Bag of 20
SKU# 72020 KSC-2 #12 - #18 AWG (Small)- Bag of 20
SKU# 72030 KSC-3 #8 - #18 AWG (Medium)- Bag of 20
SKU# 72040 KSC-4 #8 - #18 AWG (Large)- Bag of 8
SKU# 46550 King Krimper- Card of 1
SKU# 43010 Mini-Torch- QTY 1



ACE CONNECTOR™

Low Voltage
Landscape
Lighting Fitting

- Solid brass lug
- Fast curing heat shrink with adhesive lining
- Weather resistant to withstand outdoor elements
- For use in low voltage landscape lighting and direct bury applications

SKU# 90320 Small ACE Connector- Box of 50
SKU# 90325 Small ACE Connector- Bag of 2
SKU# 90330 Medium ACE Connector*- Box of 50
SKU# 90335 Medium ACE Connector*- Bag of 2
SKU# 90340 Large ACE Connector- Box of 50
SKU# 90345 Large ACE Connector- Bag of 2



*UL1838 Compliant

All trademarks, U.S. and Foreign apply. All rights reserved.



BlissLights

Perma Bright™ Laser

L-Series Low Voltage Outdoor Laser Projector

The Perma Bright L-Series Laser Light is a unique outdoor light fixture that uses holographic technology to project thousands of pin-points of light, creating a firefly effect. Use as an accent in a 12V landscape lighting system or in a holiday display to create a mesmerizing ambiance!



FEATURES AND BENEFITS:

- Cutting edge holographic technology creates superior luminous light projection for a stunning effect
- For outdoor use in low voltage landscape lighting and holiday displays
- Available in three colors LR (Red), LB (Blue), LG (Green)
- Metal housing is resistant to harsh outdoor elements
- Two installation options: power supply or landscape lighting system cable
- Class 2M laser
- 50' x 50' projection coverage
- Temperature Rating: -40°F to 90°F
- 6 hours on and 18 hours off timer built into light fixture
- Remote control included (power on/off, flash, blink, fade and twinkle)
- Five year limited warranty




SKU# 75010 Perma Bright LR (Red) - Box of 1
 SKU# 75020 Perma Bright LB (Blue) - Box of 1
 SKU# 75030 Perma Bright LG (Green) - Box of 1



DB Power Connect

Direct Bury Power Connector

- Designed for use in direct bury line voltage applications or in irrigation systems
- Pre-filled with a non-toxic SmartGel®
- Waterproof and corrosion proof
- For use in outdoor or direct burial locations
- UV and impact resistant
- Eliminates the need for heat shrinks, primers, tapes, resins, and epoxy packs
- Rated up to 600V

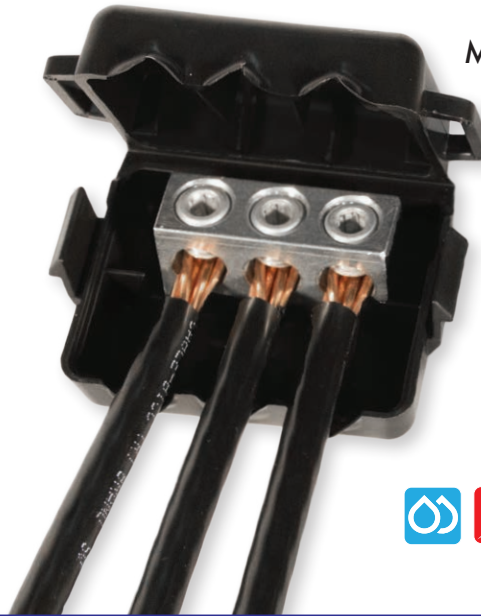

Min #14/Max #4



MADE IN USA

SKU# 98105 DB Power Connect- Bag of 3



316 IR+

- No need to strip wires
- Pre-filled with dielectric silicone sealant that never hardens
- Max Voltage: 600V
- Manufacturer approved for low voltage (30V) wet, damp and direct bury applications
- UV and impact resistant

Min #22/Max #14



MADE IN USA

Patents Pending and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

SKU# 98230 316 IR+- Bag of 30



HSC Connectors

(Heat Shrink Crimp)

- Great for well pump connections
- Transparent heat shrink allows for visible splice examination
- Crimp connector is UL Listed
- Manufacturer approved for direct bury
- Connectors span a wire range between #14 - #4 AWG



SKU# 71010 HSC1- 14g - 10g Bag of 4 contains: four (4) 14g - 10g crimps and 4 small sleeves

SKU# 71020 HSC2- 8g - 12g Bag of 4 contains: one (1) 14g - 10g crimp, three (3) 8g crimps and 4 small sleeves

SKU# 71030 HSC3- 6g - 8g Bag of 4 contains: one (1) 8g crimp, three (3) 6g crimps, 1 small sleeve and 3 large sleeves

SKU# 71040 HSC4- 4g - 8g Bag of 4 contains: one (1) 8g crimp, three (3) 4g crimps, 1 small sleeve and 3 large sleeves



DRYCONN® WATERPROOF CONNECTORS

Tan Low Voltage

- Waterproof and corrosion proof
- Pre-filled with dielectric petroleum sealant that never hardens
- Suitable for low voltage applications including irrigation systems
- One-step installation saves time and money
- No pre-twisting required
- Eliminates the need for multi-step products

SKU# 20101 Tan Low Voltage- Card of 4
SKU# 20111 Tan Low Voltage- Bag of 15
SKU# 20122 Tan Low Voltage- Bag of 50
SKU# 20136 Tan Low Voltage- Canister of 50

Min #22/Max #6



MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

DRYCONN® WATERPROOF CONNECTORS

Gray/Gray & Blue/Blue Low Voltage

- UL 486D Listed (Gray/Gray only) and 600V rated
- Waterproof and corrosion proof
- Pre-filled with dielectric silicone sealant that never hardens
- One-step installation saves time and money
- No pre-twisting required
- Low voltage (30V Max) suitable for use in damp, wet and direct bury applications

SKU# 10111 Gray/Gray- Bag of 20
SKU# 10222 Blue/Blue Low Voltage- Bag of 20
SKU# 10241 Blue/Blue Low Voltage- Canister of 100



Gray/Gray
Min #22/Max #12



Blue/Blue
Min #22/Max #12



MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.


DRYCONN® WATERPROOF CONNECTORS

Direct Bury GTSR

Grease Filled Tube w/Strain Relief

- Pre-filled with petroleum grease that never hardens
- Waterproof and corrosion proof
- Easy-latch lid provides strain relief
- Includes orange or yellow nut for wire splicing
- Manufacturer approved for direct bury
- Perfect for low voltage applications up to 50V

SKU# 20205 GTSR w/Orange Nut- Bag of 25
SKU# 20210 GTSR w/Yellow Nut- Bag of 25

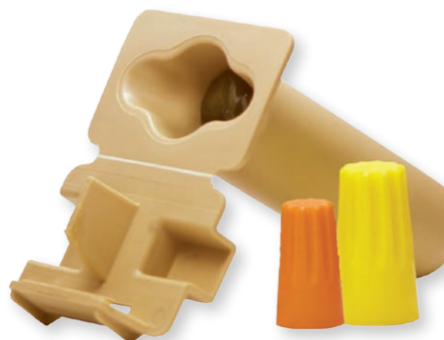

Orange Nut
Min #22/Max #14

Yellow Nut
Min #18/Max #10



MADE IN USA OF US AND FOREIGN PARTS

KNOW THE CODE! Aqua Series Connectors are UL 486D Listed and comply with the 2008, 2011 and 2014 National Electric Code

DRYCONN®

WATERPROOF CONNECTORS

Aqua Series

- Waterproof and corrosion proof
- Pre-filled with dielectric silicone sealant that never hardens
- One-step® installation saves time and money
- No pre-twisting required
- Multiple sizes for all applications
- UL 486D Listed and 600V rated
- Designed for outdoor/electrical wire splices, especially those exposed to condensation, water vapors or dust



Aqua/Orange

Min #22/Max #12



Aqua/Red

Min #22/Max #8



Aqua/Blue

Min #14/Max #6



- SKU# 62110 Aqua/Orange- Card of 6
 SKU# 62125 Aqua/Orange- Bag of 25
 SKU# 62135 Aqua/Orange- Bag of 100
 SKU# 62146 Aqua/Orange- Canister of 150
 SKU# 62150 Aqua/Orange- Bag of 500
 SKU# 62210 Aqua/Red- Card of 5
 SKU# 62225 Aqua/Red- Bag of 20
 SKU# 62235 Aqua/Red- Bag of 100
 SKU# 62241 Aqua/Red- Canister of 100
 SKU# 62250 Aqua/Red- Box of 500
 SKU# 62310 Aqua/Blue- Card of 3
 SKU# 62325 Aqua/Blue- Bag of 15
 SKU# 62335 Aqua/Blue- Bag of 50
 SKU# 62340 Aqua/Blue- Bag of 250



All products
available in cards



All products
available in bags



Select products
available in canisters



MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

ELECTRICAL

Did you know there was a code change concerning outdoor splices?

The goal of King Innovation's

"Know the Code" initiative is to provide information to the industry; keeping professionals informed of all requirements in order to reduce the risk of electric shock, corrosion, and product failures. King Innovation DryConn Waterproof Connectors are UL 486D Listed and comply with the 2008, 2011 and 2014 National Electric Code.

Compliance with the 2008, 2011 and 2014 NEC Handbook means when making a splice in a wet or damp location it is *required* that a UL 486D Listed splicing method be used. Basically, all outdoor electrical connections require a waterproof connector, even in waterproof enclosures.

The benefits to Electricians when using DryConn Waterproof Connectors are:

- Installations are made according to the National Electrical Code
- Avoids costly rework due to failed inspections and/or warranty issues
- Avoids connector corrosion at the splice
- Reduces the risk of burnouts and fires
- Complete the job with confidence

REFERENCES

1. NEC 2014

Article 100 Definitions: Listed, Location, Wet.

Articles 110.14, 300.5 (B), 300.38, 300.5 (E), 300.9, 310.10 (C)(3), 314.15, 314.30, 410.10, 675.17

2. NEC 2011

Article 100 Definitions: Listed, Location, Wet.

Articles 110.14, 300.5 (B), 300.5 (E), 300.9, 310.10 (C)(3), 314.30, 410.10, 675.17

3. NEC 2008

Article 100 Definitions: Listed, Location, Wet.

Articles 110.14, 300.5 (B), 300.5 (E), 300.9, 310.8 (C)(3), 314.30, 410.10, 675.17

4. Sealed Wire Connector System

UL 486D Scope 1.1

See full code explanations in 'NEC Code References to UL 486D Uses in Wet Locations'

DIRECT BURY CONNECTORS

KNOW THE CODE! Direct Bury Connectors are UL 486D Listed and comply with the 2008, 2011 and 2014 National Electric Code

DRYCONN®
WATERPROOF CONNECTORS

Direct Bury

- UL 486D Listed and 600V rated
- Pre-filled with dielectric silicone sealant that never hardens
- Waterproof and corrosion-proof
- One-step® installation saves time and money
- Direct Bury, no junction box is required
- No pre-twisting required

SKU# 10444 King 4 Yellow- Bag of 10

SKU# 10555 King 5 Red- Bag of 10

SKU# 10600 King 6 Blue- Card of 2

SKU# 10666 King 6 Blue- Bag of 10

SKU# 10670 King 6 Blue- Box of 100

SKU# 10975 King 9 Dark Blue- Box of 75

SKU# 10990 King 9 Dark Blue- Card of 2

SKU# 10999 King 9 Dark Blue- Bag of 8

King 5 Red
Min #14/Max #10



King 4 Yellow
Min #18/Max #12



King 6 Blue
Min #22/Max #8



King 9 Dark Blue
Min #14/Max #6




MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

Contractors' CHOICE™

Conventional Dry Splices

- Designed for conventional copper/copper dry splices, available in nut, wing and push-in style
- Tough Thermoplastic Flame Retardant Shell
- Industry color-coded and suitable for wire combinations from #22 through #10
- Steel plated spring and flame-retardant housing
- Rated between 300V and 600V
- No pre-twisting required
- Perfect for indoor, dry applications for both commercial and residential installations
- Nut driver included in all bagged items

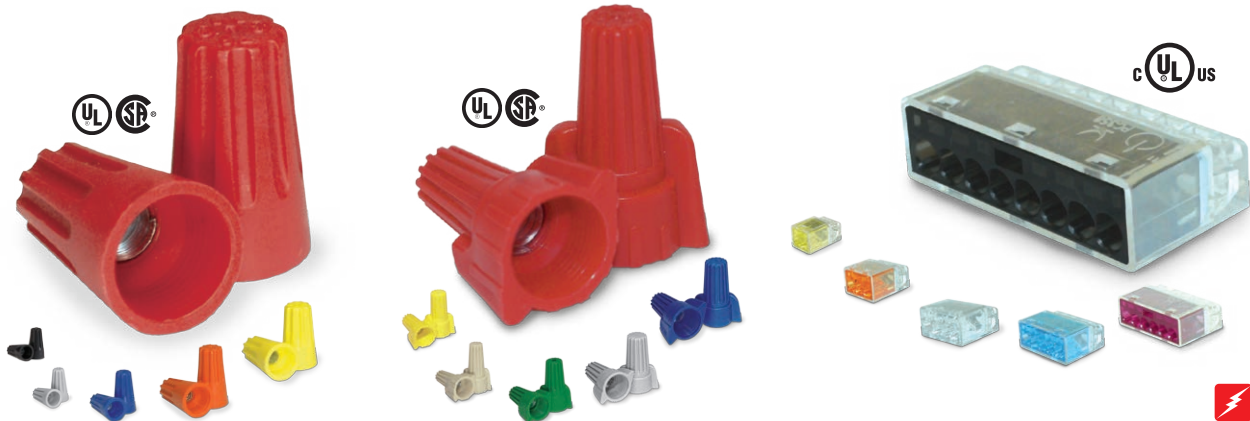

All CC Products available in Boxes



Select CC Products available in Bags



Select CC Products available in Buckets



Select CC Products available in Drums



SKU# 67061

Black Nut- Bag of 1,000

SKU# 67065

Black Nut- Box of 100

SKU# 67011

Gray Nut- Bag of 1,000

SKU# 67015

Gray Nut- Box of 100

SKU# 67021

Blue Nut- Bag of 1,000

SKU# 67025

Blue Nut- Box of 100

SKU# 67031

Orange Nut- Bag of 500

SKU# 67033

Orange Nut- Bucket of 5,000

SKU# 67035

Orange Nut- Box of 100

SKU# 67039

Orange Nut Bulk Drum of 20,000

SKU# 67041

Yellow Nut- Bag of 500

SKU# 67045

Yellow Nut- Box of 100

SKU# 67051

Red Nut- Bag of 500

SKU# 67055

Red Nut- Box of 100

SKU# 67071

Yellow Wing- Bag of 500

SKU# 67073

Yellow Wing- Bucket of 8
500 pc Bags (4,000 pcs)

SKU# 67075

Yellow Wing- Box of 100

SKU# 67079

Yellow Wing- Bulk Drum of 35,000

SKU# 67081

Tan Wing- Bag of 500

SKU# 67083

Tan Wing- Bucket of 6
500 pc Bags (3,000 pcs)

SKU# 67085

Tan Wing- Box of 100

SKU# 67089

Tan Wing- Bulk Drum of 30,000

SKU# 67091

Red Wing- Bag of 500

SKU# 67093

Red Wing- Bucket of 4
500 pc Bags (2,000 pcs)

SKU# 67095

Red Wing- Box of 100

SKU# 67099

Red Wing
Bulk Drum of 20,000

SKU# 27120

Green Wing- Bag of 25

SKU# 27143

Green Wing- Bucket of 5 -
500 pc Bags (2,500)

SKU# 27145

Green Wing- Box of 500

SKU# 27190

Green Wing
Bulk Drum of 25,000

SKU# 67101

Gray Wing- Bag of 250

SKU# 67105

Gray Wing- Box of 50

SKU# 67111

Blue Wing- Bag of 100

SKU# 67115

Blue Wing- Box of 50

SKU# 67205

Yellow Push-In- Box of 100

SKU# 67215

Orange Push-In- Box of 100

SKU# 67225

Ivory Push-In- Box of 75

SKU# 67235

Blue Push-In- Box of 50

SKU# 67245

Purple Push-In- Box of 50

SKU# 67255

Black Push-In- Box of 40

CONTRACTORS' CHOICE

GORILLA NUTS®

CUSHION GRIP WIRE CONNECTORS



Blue/Gray
Min 4 #14/Max 2 #6

Orange/Blue
Min 3 #20/Max 3 #12

Red/Yellow
Min 2 #18/Max 2 #8



- Eliminates pain and numbness in hands and fingers
- Less inventory, improved coverage, fits a wide wire range
- Unique design allows for better torque and twisting leverage
- Comfortable cushion grip offers improved slip resistance
- Flexible WorkSkirt™ protects against over stripping
- Square cut spring provides a secure connection and wire bite with first twist

SKU# 68105 Orange/Blue- Bag of 10
 SKU# 68110 Orange/Blue- Box of 100
 SKU# 68130 Orange/Blue- Canister of 300
 SKU# 68170 Orange/Blue- Box of 5,000
 SKU# 68190 Orange/Blue- Drum of 25,000
 SKU# 68205 Red/Yellow- Bag of 10
 SKU# 68210 Red/Yellow- Box of 100
 SKU# 68230 Red/Yellow- Canister of 300
 SKU# 68270 Red/Yellow- Box of 5,000
 SKU# 68290 Red/Yellow- Drum of 25,000
 SKU# 68310 Blue/Gray- Box of 50
 SKU# 68325 Blue/Gray- Canister of 250



U.S. Pat. 7,560,645, 8,067,692, 8,525,026 and additional Patents Pending apply.
 All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

ALUMICONN®

ALUMINUM TO COPPER LUG

Aluminum to Copper Lug

- Secure, mechanical connection of conductors
- Runs approximately 25°F cooler than purple twist-ons*
- Provides a safer connection
- Separate ports eliminate intermixing of conductors
- One piece for easy installation
- Dielectric silicone inhibitor reduces corrosion of connection
- Tin-plated lug and nickel-plated screws
- Max voltage: 300V
- Aluminum Wire Range: #12 - #10 solid AWG
- Copper Wire Range: #18 - #10 solid and stranded AWG
- UL 486C Listed to meet U.S. and Canadian standards
- Temperature rating of insulating material: 105°C
- Suitable for aluminum to aluminum, aluminum to copper, and copper to copper wire splices
- Approved by CPSC and insurance companies
- Available in 2-Port and 3-Port styles

- ✓ UL LISTED.
- ✓ INSURANCE COMPANY ENDORSED.
- ✓ CONSUMER PRODUCT SAFETY COMMISSION APPROVED.
- ✓ COMPACT FIT.
- ✓ LOW COST.
- ✓ SECURE CONNECTION.
- ✓ FIRE PREVENTATIVE.
- ✓ PERMANENT SOLUTION.

SKU# 95015 AlumiConn 2 Port- Bag of 10
 SKU# 95025 AlumiConn 2 Port- Bag of 25
 SKU# 95035 AlumiConn 2 Port- Box of 100
 SKU# 95045 AlumiConn 2 Port- Box of 1000
 SKU# 95085 AlumiConn 2 Port- Box of 2500
 SKU# 95104 AlumiConn 3 Port- Card of 2
 SKU# 95110 AlumiConn 3 Port- Card of 10
 SKU# 95125 AlumiConn 3 Port- Bag of 25
 SKU# 95135 AlumiConn 3 Port- Box of 100
 SKU# 95145 AlumiConn 3 Port- Box of 1,000
 SKU# 95185 AlumiConn 3 Port- Box of 2,500

AlumiConn 3 Port*

Min #18/Max #10



AlumiConn 2 Port

Min #18/Max #10



MADE IN USA

U.S. Pat. 9,172,167 and additional Patents Pending apply.
 All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.


DRYCONN[®]

WATERPROOF CONNECTIONS



VisiLock[®] w/SmartGel[®]

Anode Splice Box

- Waterproof and corrosion proof
- Pre-filled with a non-toxic gel that eliminates hazmat requirements
- Re-enterable, semi-transparent, encapsulated splice allows for visible splice examination
- Locking mechanism centers splice in box
- One piece for fast, easy installation
- Eliminates heat shrinks, primers, tapes, and epoxy packs
- Temperature Rating: -40°C (-40°F) to 90°C (194°F)
- Amperage not to exceed maximum temperature of the conductor
- Designed to protect cathodic splices from corrosion
- For making tap or branch splices on insulated cables rated up to 100V

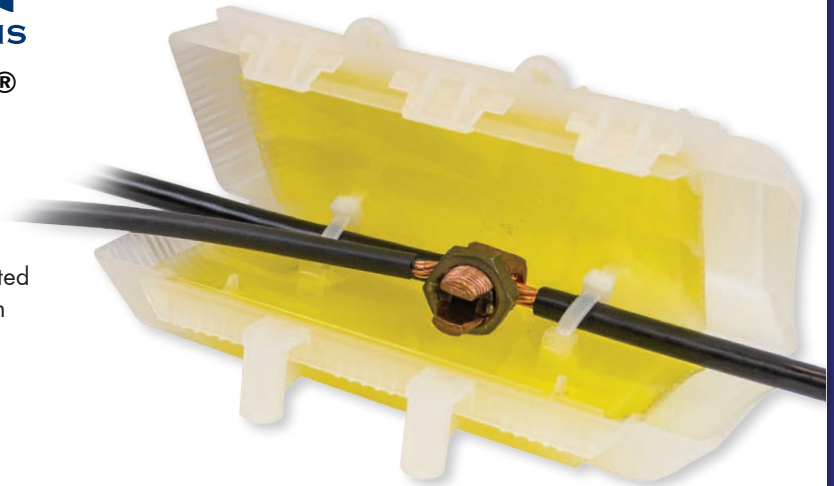

VisiLock

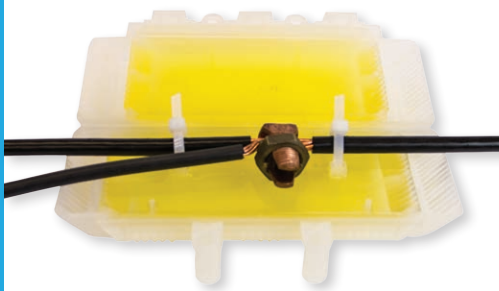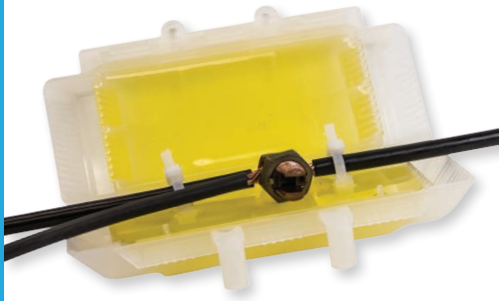

SKU# 98010 VisiLock- Box of 1



MADE IN USA

U.S. Patent 7,384,297 and 7,431,611. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

DRYCONN®

WATERPROOF CONNECTORS

King 6 Connectors

- UL 486D Listed and 600V Rated
- Temperature Rating: 105 °C (221 °F)
- Silicone Sealant: -45 °F to 400 °F
- Rated for underground, direct bury wire splices up to 600V
- Designed for tracer splices and cathodic applications

SKU# 10666 King 6 Blue- Bag of 10
SKU# 31556 King 6 Yellow- Bag of 10



King 6 Yellow

Min #22/Max #8



King 6 Blue

Min #22/Max #8



MADE IN USA

U.S. Pat. 5,771,578 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

DRYCONN®

WATERPROOF CONNECTORS

DBSR®

Direct Bury w/Strain Relief

- UL 486D Listed and 600V rated
- Pre-filled with dielectric silicone sealant that never hardens
- Waterproof and corrosion proof
- Easy latch lid provides strain relief
- One piece for easy installation
- Silicone Sealant Temperature: -45 °F to 400 °F
- Designed for tracer splices and cathodic applications

SKU# 63315 DBSR Yellow- Bag of 10
SKU# 63350 DBSR Yellow- Box of 100
SKU# 63615 DBSR Aqua- Bag of 10
SKU# 63650 DBSR Aqua- Box of 100



DBSR Yellow

Min #22/Max #6



DBSR Aqua

Min #22/Max #6



MADE IN USA

U.S. Pat. 7,170,005, 5,771,578, 6,815,616, 7,122,742 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

DRYCONN®

WATERPROOF CONNECTORS

DB Lugs


Direct Bury

- Waterproof and corrosion proof
- Pre-filled with dielectric silicone sealant that never hardens
- Install service line without cutting the main line
- Installs in one minute or less
- Manufacturer approved for direct bury
- Silicone Sealant Temperature Rating: -45 °F to 400 °F
- Designed for low voltage tracer splices and cathodic applications up to 50V

SKU# 90120 DB Lug Yellow- Bag of 5
SKU# 90220 DB Lug Aqua- Bag of 5

DB Lug Yellow

Min #14/Max #10

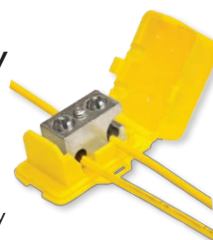

DB Lug Aqua

Min #14/Max #10



MADE IN USA

U.S. Pat. 7,044,776, 7,677,932, 7,223,132, 7,507,126, 7,988,503 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

DRYCONN®

WATERPROOF CONNECTORS

Split Bolt Housing

- Designed for low voltage tracer splices and cathodic applications up to 50V
- Use for making tap or branch splices
- Pre-filled with a non-toxic SmartGel® that eliminates hazmat requirements
- Waterproof and corrosion proof
- Eliminates the need for heat shrinks, primers, tapes and epoxy packs
- One piece for fast, easy installation
- Installs in one minute or less
- For use in outdoor or direct-burial locations
- Wire Range: #14 - #10 AWG

SKU# 69205 Split Bolt Housing Yellow- Bag of 10
SKU# 69105 Split Bolt Housing Aqua- Bag of 10

Split Bolt Housing Yellow

Min #14/Max #10



Split Bolt Housing Aqua

Min #14/Max #10



MADE IN USA

U.S. Pat. 7,950,956 and additional Patents Pending apply. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.



Siphon King Display Rack

(See page 33 for details)

- SKU# 48024 24" Pump x 36" Hose- Bag of 1
- SKU# 48036 36" Pump x 36" Hose- Bag of 1
- SKU# 48072 36" Pump x 72" Hose- Bag of 1
- SKU# 48230 24" Pump Extension- Bag of 1

Siphon King® Utility Pumps

- Made in USA
- Corrosion proof
- Provides quick removal of water
- Self-priming, lightweight utility pump
- High strength, ergonomic handle can withstand extreme temperatures and harsh usage
- 36" pump provides quick removal of 1 gallon in 4 strokes
- 24" extension available; fits on to existing pump to access hard to reach areas
- Steel shaft improves strength
- Flexible discharge hose for directing water evacuation
- Removable intake foot for easy cleaning
- Perfect for removing water from valve boxes, meter pits, pipe trenches, and anywhere water accumulates



MADE IN USA

U.S. Pat. 7,726,231. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

Siphon King Gas Powered Pump

- 4-cycle, single cylinder, air-cooling gasoline engine
- Excellent for high volume water transfer
- Unrestricted flow 40 gallons per minute
- 1" inlet/outlet diameter
- Includes two (2) 6' hoses for intake and discharge, garden hose adaptor, and intake filter
- Replacement parts available



Intake Filter



Garden Hose Adaptor



Back



Front

SKU# 48350 Gas Powered Pump- Box of 1



Siphon King Gas Pit Pump Adaptor


- Connects directly to the drip pot to remove standing water in low pressure gas systems
- Has a 3/4" NPT metal thread insert that will not strip away, even with repeated use

SKU# 48210 Gas Pit Pump Adaptor- Bag of 1

Siphon King Syringe Sucker

- For use in small spaces, including golf valve bodies, meter pits, narrow trenches, etc.
- 3/4" barb fitting with 12" pipe attachment
- Replace 12" pipe with any length funny pipe for maximum flexibility and reach

SKU# 48215 Syringe Sucker- Card of 1

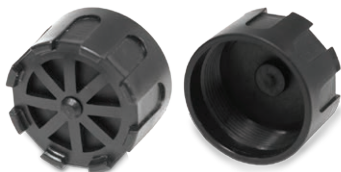

Siphon King Pump Assembly Foot

- Screws on easily
- Eliminates problems caused by mud buildup and debris to improve suction

SKU# 48205 Pump Assembly Foot- Bag of 1

Siphon King 72" Extension/Replacement Hose w/Coupler

- 72" flexible hose directs water away from work site
- Coupler provides extension to existing pump hose

SKU# 48272 72" Extension/Replacement Hose- Bag of 1



Siphon King Jr.

- Intake and discharge transfer system
- May be used to transfer liquids, remove water, change oil, siphon gas, or inflate small objects
- Complete with two 50" siphon hoses, a dipstick tube, and an air pressure hose

SKU# 48050 Siphon King Jr. w/50" Hose- Pkg of 1

SnapTap® SADDLES

- Ergonomic handle with 50% more surface area to cushion fingers and provide maximum comfort
- #1 in speed, comfort and durability
- Available with a FPT, 90° Elbow or Straight Barb fitting
- No tools, fittings, or clamps needed
- Ergonomic hurricane handle provides comfortable, quick rotations
- Short thread design allows for the quickest, easiest installation possible without dirt or pebble clogging
- Patented cutting tip cleanly cuts polyethylene pipe for a tight seal every time
- Side snap latch provides a visible, secure connection
- Shorter working height requires less digging
- For both 80# and 100# 1" Poly Pipe

SKU# 22311 1" x 1/2" FPT Saddle- Bucket of 75
 SKU# 22316 1" Saddle w/90° Elbow- Bucket of 75
 SKU# 22321 1" Saddle w/Straight Barb- Bucket of 75
 SKU# 22331 1" x 3/4" FPT Saddle- Bucket of 75



MADE IN USA

U.S. Pat. 6,510,865 and 6,767,033. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

UNIVERSAL! SnapTap® SADDLES

- Ergonomic handle with 50% more surface area to cushion fingers and provide maximum comfort
- Universal adjustable latch provides a visible, secure connection
- Fits 3/4", 1" and 1 1/4" Poly (PE) Pipe
- Installation requires no fittings, no clamps
- Available with a FPT, 90° Elbow or Straight Barb fitting
- Patented cutting tip cleanly penetrates for a tight seal every time

SKU# 22511
 Universal 1/2" FPT Saddle- Bucket of 75
 SKU# 22516
 Universal Saddle w/90° Elbow- Bucket of 75
 SKU# 22521
 Universal Saddle w/Straight Barb- Bucket of 75



MADE IN USA OF US AND FOREIGN PARTS

U.S. Pat. 6,510,865 and 6,767,033. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

KING DRAINS® Soft Grip Drain

- Ergonomic soft grip design makes for comfortable, slip-free installation
- Complements end-of-season blow-outs to remove residual water from irrigation systems and provide freeze protection
- Utilized for both main and lateral line applications
- Patented backflow check prevents contamination
- Broad dispersing pad protects against root and soil penetration
- Self-cleaning dirt arrestor screen prevents clogging of drain
- Pressure sensitive valve releases water slowly at root level



Soft Grip Drain



MADE IN USA

U.S. Patent Numbers 6,886,585 and D568,450. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

SKU# 22163 1/2" MPT- Bag of 25

SKU# 23167 3/4" MPT- Bag of 25

KING DRAINS® End of Line Drain

- Designed for 1" Class or Schedule 40 PVC pipe
- Complements end-of-season blow-outs to remove residual water from irrigation systems and provide freeze protection
- Pressure sensitive valve releases water slowly at root level
- Self-cleaning dirt arrestor screen prevents clogging of drain



3/4" x 1/2" FPT



1" x 1/2" FPT



1" x 3/4" FPT



1" MPT x 1" INS



MADE IN USA OF US AND FOREIGN PARTS

U.S. Pat. 6,886,585 and D568,450. All other trademarks, U.S. and Foreign Patents Pending apply. All Rights Reserved.

SKU# 15140 3/4" x 1/2" FPT- Bag of 10

SKU# 16142 1" x 1/2" FPT- Bag of 10

SKU# 17145 1" x 3/4" FPT- Bag of 10

SKU# 21155 1" MPT x 1" INS- Bag of 5



- Heavy duty PVC
- UV resistant
- Max gallons: 15
- Max tree size: 1" - 4" diameter
- Max tree size can be doubled by zipping two Sapling Soaker bags together
- 5-9 hours of drip time
- New! Slow release emitters for even water distribution



Patents Pending and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

SKU# 44020 Sapling Soaker- Bag of 1



- Heavy duty polyethylene
- UV resistant
- Max gallons: 20
- Max tree size: 6" diameter
- Heavy duty Velcro strap secures Sapling Soaker in high winds preventing blow away
- 5-8 hours of drip time
- New! Now with 1/4 turn cap for quick fill




Patents Pending and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

SKU# 44010 Sapling Soaker Ring- Bag of 1

Ball Bearing Probe

- Use to locate sprinkler lines, measure moisture penetration, or avoid roots, pipe and rocks when digging
- Rounded head reduces risk of damage to tree roots, wires, pipelines, etc.
- Made of durable steel
- Lightweight for easy portability
- For commercial or residential use

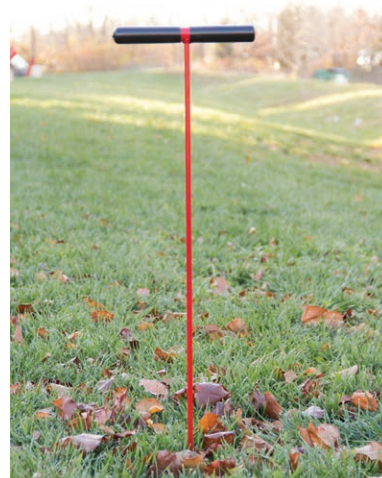

MADE IN USA



SKU# 25210 Ball Bearing Probe- Unit of 1

LEAK-B-GONE™

PVC LEAK STOPPER RING

- 60 second solution to repair leaking PVC joints
- Available in seven sizes, for 3/4", 1", 1 1/4", 1 1/2", 2", 3", and 4" PVC pipe
- Easy installation, no tools required
- Provides 360° leak protection, tested to 200 PSI
- For commercial and residential use

SKU# 45015 3/4" Rings- Bag of 10
 SKU# 45020 1" Rings- Bag of 10
 SKU# 45025 1 1/4" Rings- Bag of 10
 SKU# 45030 1 1/2" Rings- Bag of 10
 SKU# 45035 2" Rings- Bag of 10
 SKU# 45040 3" Rings- Bag of 10
 SKU# 45045 4" Rings- Bag of 10
 SKU# 45050 Assorted 3/4", 1", 1 1/4" & 1 1/2" Rings Bag of 4
 SKU# 45055 Assorted 2", 3" & 4" Rings Bag of 3




U.S. Pat. 8,371,622, 8,579,296, 8,525,026 and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.



IRRIGATION

KING GRIPS

- Quick coupling and release saves time
- No steel splinters
- Fits all pipe pulling equipment
- Plated for rust prevention
- No tape required
- Available in a convenient kit
- For 3/4" to 2" Polyethylene Pipe and 3/4" to 4" PVC Pipe
- Durable, closed-end design protects pipe from soil entry
- Minimum pipe grip eliminates wasted pipe material

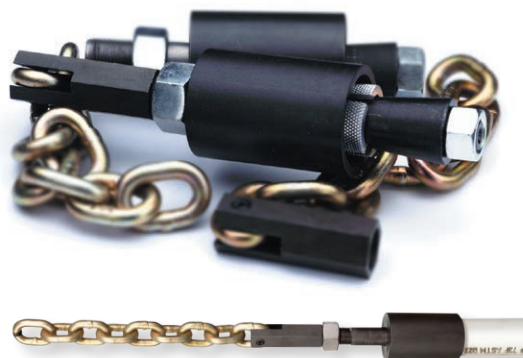

SKU# 81701 1" 2" Diameter Bullet w/1" to 1 1/2" Shaft, 1" Grip Only- QTY 1
 SKU# 81315 1" Chain with Male and Female Adapter 3/4" Hex Stock- QTY 1
 SKU# 81314 Female Adapter 3/4" Hex Stock- QTY 1
 SKU# 81311 1" Heavy Duty Chain w/ML and FML Adapter 1" Hex Stock- QTY 1
 SKU# 81801 1" PVC Kit Grip and Chain- QTY 1
 SKU# 81802 1" 80# Poly Kit Grip and Chain- QTY 1
 SKU# 81803 1" 100# Poly Kit Grip and Chain- QTY 1
 See price list for a complete list of SKU's

MADE IN USA



Mesh Grips

- For pulling irrigation PVC and Poly Pipe, directional boring pull backs, insulated wire, wire rope, tubing, and bare conductors
- Reusable
- Available with swivels built into grip
- Coated galvanized cable
- Reverse weave and single wire bail
- Work load capacity of 1500 to 3500 lbs
- Various grip lengths, pipe ranges, and weaves available



MADE IN USA



See price list for a complete list of SKU's

2" Ratchet Poly/PVC Pipe Cutter with Grounding Stud

- Static dissipating grounding stud increases safety
- Stainless Steel blade for precision cuts
- Cuts up to 2" SCH40, 200 Class PVC Pipe or Yellow (PE) Gas Pipe
- Cuts up to 2" Poly (PE) Pipe
- Strong and durable cast aluminum body
- Patent Pending
- Easy to change blade



SKU# 46360 2" Ratchet- Card of 1

SKU# 46351 2" Ratchet Replacement Blade- Card of 1



2" Ratchet Poly/PVC Pipe Cutter

- Cuts up to 2" SCH40, Class PVC Pipe or Yellow (PE) Gas Pipe
- Cuts up to 2" Poly (PE) Pipe
- Stainless Steel blade for precision cuts
- Strong and durable cast aluminum body
- Easy to change blade



SKU# 46350 2" Ratchet- Card of 1

SKU# 46351 2" Ratchet Replacement Blade- Card of 1



Poly/PVC Pipe Cutter

- Cleanly cuts up to 1 1/2" Poly (PE) Pipe and up to 1 1/4" Class PVC Pipe
- Durable cast aluminum body
- Hardened steel blade



SKU# 46320 Poly Pipe Cutter- Card of 1

SKU# 46321 Poly Pipe Cutter Replacement Blade- Card of 1



1 1/4" Ratchet Poly/PVC Pipe Cutter

- Cleanly cuts up to 1 1/4" SCH40, Class PVC Pipe and up to 1 1/4" Poly (PE) Pipe
- Durable cast aluminum body
- Pointed steel blade for ease of cutting




SKU# 46310 1 1/4" Ratchet- Card of 1

SKU# 46311 1 1/4" Ratchet Replacement Blade- Card of 1



Cable Saw

- 36" Cable Saw
- For fast cutting of PVC plumbing, drain, and irrigation pipe
- Great for tight spaces

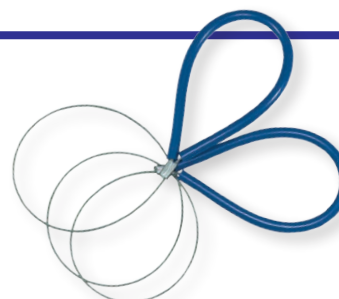

SKU# 46300 Cable Saw- Card of 1



I-tool®

Irrigation Multi-Tool

- 15 tools, includes 4 Irrigation Tools
- Compatible with all major brands
- Punch precise holes in poly
- Quickly remove sediment
- Effortlessly adjust arc
- Pull up any brand sprinkler head
- Lightweight compact style
- Precise construction
- Withstands extended use

SKU# 46600 I-tool Card of 1



Carrying case included



U.S. Pat. D731,270S, D742,714 and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

L-tool®

Lighting Multi-Tool

- 18 total tools
- Install, repair and troubleshoot landscape lighting systems
- Compatible with all major landscape lighting fixture brands
- Locking blades
- Precise construction
- Withstands extended use

SKU# 46700 L-tool Card of 1



Carrying case included



U.S. Pat. D742,714 and all other trademarks, U.S. and Foreign Patents apply. All Rights Reserved.

IrriMeter™

- Auto-ranging smart meter for irrigation applications
- Ohm / DCV / ACV
- Use to quickly and accurately troubleshoot irrigation systems
- Precision measurements for 100% confidence
- Easy one-switch operation and clear LCD display
- Convenient pocket sized meter

SKU# 42010 IrriMeter- Unit of 1



GORILLA WIRE STRIPPER™

Gorilla Jacket Stripper

- For use in home installations and outdoor wiring
- Ergonomic comfort grip handle eases soreness in hands and fingers
- Strips outer jacket of UF or NM-B cable in one motion
- Won't nick copper wire
- Works in boxes and enclosures
- Made of heat treated carbon steel
- Min/Max Strip: #14 - #10 AWG

- For use with the following: NM-B non-metallic sheathed cable, UF cable, Irrigation 2-wire cable, #10, 12 and 14 gauge cable

Gorilla Wire Strippers

- Ergonomic comfort squeeze handle eases hand fatigue and provides non-slip grip
- Features handle lock closure for added safety
- Tools available for multiple solid and stranded wire gauges.



46005

46501

46515



SKU# 46200 Gorilla Jacket Stripper- Card of 1

SKU# 46005 Gorilla Wire Stripper w/Handle Lock #20-#10 AWG- Card of 1

SKU# 46501 Gorilla Wire Stripper/Crimper/Cutter#22-#10 AWG- Card of 1

SKU# 46515 Gorilla Wire Stripper/Cutter #20-#10 AWG- Card of 1

MADE IN USA



Bucket, Lid and Divider

Buckets:

- High impact pail with heavy duty handle
- Great for organization and storage needs
- Lid sold separately

Dividers:

- Fits cleanly into buckets to divide into four sections
- Carry pipe fittings, saddles, connectors, and more without intermixing sizes and styles
- Durable material withstands prolonged use



SKU# 47400 Logo Bucket QTY 1
 SKU# 47410 Logo Bucket Lid QTY 1
 SKU# 47420 Logo Bucket Dividers QTY 1

MADE IN USA



Storage Organizers

- Perfect for storage and organization
- High-impact plastic pail with heavy duty handle
- Storage trays fit snugly inside pail
- Full size sorter trays interchange with half size trays
- Water-resistant lids are easy to put on and take off
- Available in multiple tray quantities for customization



Product not included

SKU# 47502 5 Gallon Yellow Pail- 1 Lid, 2 Large and 2 Small Black Trays


SKU# 47405 5 Gallon Yellow Pail- 1 Lid, 3 Large Black Trays
 SKU# 47506 5 Gallon Yellow Pail- 1 Lid, 6 Small Black Trays

MADE IN USA



Gray Tote Tray

- Easily transport glue, tools, and other supplies to and from job sites
- Oversized for maximum capacity without the worry of spilling
- Storage grooves on the side of handle allow for smaller supplies, such as connectors
- Heavy duty construction

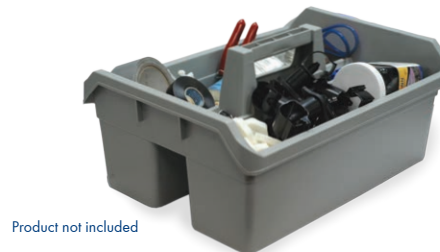

Product not included


SKU# 47027 Gray Tote Tray- QTY 1

MADE IN USA



Power Cords/Pigtails

- UL Listed for safety
- For multiple res/com applications including power to irrigation controllers, dishwashers, garbage disposals, etc.
- Three (3) conductor cord
- Wire Gauge: #16 stranded wire (6' straight cord uses #14 stranded wire)
- Plug available straight or at a 90° angle for versatility
- For indoor/outdoor use

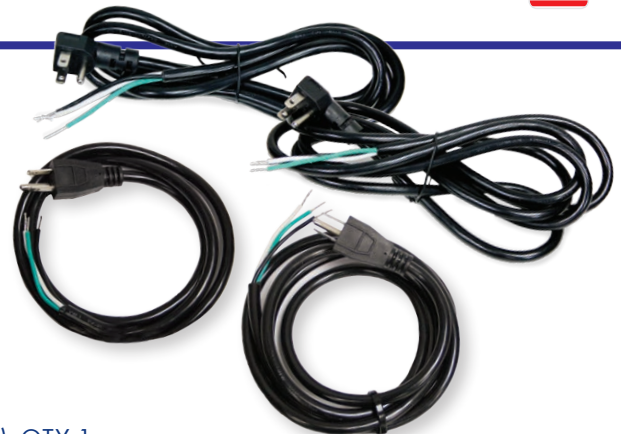

SKU# 25260 6' Power Cord with 90° angle plug- QTY 1
 SKU# 25261 6' Power Cord with straight plug (Dishwashers)- QTY 1
 SKU# 25280 8' Power Cord with 90° angle plug- QTY 1
 SKU# 25281 3' Power Cord with straight plug (Garbage Disposals)- QTY 1



Anchor Kit

- Kit includes 100 #10 x 1" slotted Phillips combination pan head screws
- Kit includes 100 1/4" x 1" plastic anchors
- Free carbide-tipped drill bit included



SKU# 25130 Anchor Kit- QTY 1
 SKU# 25140 Drywall Plastic Anchors- QTY 1
 SKU# 25150 Drywall Zinc Anchors- QTY 1

Drywall Anchor Kit

- Pre-drills its own small precise hole in drywall
- Attaches through drywall
- Available in zinc or plastic anchors
- Kit includes 50 pan head screws and anchors




MADE IN USA



Nylon Cable Ties

- Raised ridges on bent tip for a sure grip
- Nylon toughness
- UL 94V-2 flammability classification
- Complies with military spec
- Self-locking, one-piece, low profile head conserves space
- Bent tip on all series of cable ties allows easier pick-up insertion, and pull-up
- V-shaped raised ridges on bent tip gives a sure grip and easier pull-up
- Engineered and manufactured for excellent performance
- For maximum comfort, smooth rounded edges will not cut hands or insulation

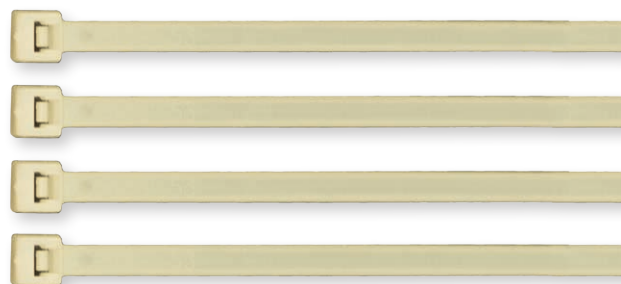


SKU# 76003 4" Nylon Cable Ties- Bag of 100
 SKU# 76007 7" Nylon Cable Ties- Bag of 100
 SKU# 76011 11" Nylon Cable Ties- Bag of 100
 SKU# 76015 14.5" Nylon Cable Ties- Bag of 100

MADE IN USA



Black Cable Ties

- Easy to use ties for landscape lighting on decks or trees, home, electrical, or any fastening needs
- Self-locking, one-piece, low profile head conserves space
- For maximum comfort, smooth rounded edges will not cut hands or insulation
- Rated for indoor and outdoor use
- UV Resistant
- Available in 8", 11", 14", 18" and 24" sizes
- 8" cable tie available with or without screw mount head
- 1" x 1" adhesive black cable mount available

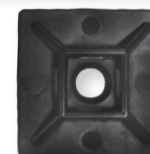

SKU# 76108 8" Black Cable Ties- Bag of 100
 SKU# 76111 11" Black Cable Ties- Bag of 100
 SKU# 76114 14" Black Cable Ties- Bag of 100
 SKU# 76118 18" Black Cable Ties- Bag of 50
 SKU# 76124 24" Black Cable Ties- Bag of 50
 SKU# 77108 8" Black Cable Ties w/Screw Mount- Bag of 100
 SKU# 78001 Black Cable Mount- Bag of 100

MADE IN USA



Vinyl Electrical Tape

- General purpose 7 mil tape
- Weather resistant, flame retardant
- Use for all mechanical and electrical applications
- Use as a primary insulation under 600V, or as a protective outer jacket over splices
- UL 510 Listed, economical grade of pressure-sensitive vinyl tape

SKU# 86001 Vinyl Electrical Tape- QTY 1



PTFE Thread Tape

- 520" roll
- Creates a watertight seal around threaded pipe joints
- Resists water and corrosion
- Flexible and easy to tear for quick installation
- 0.004" thick, medium density
- Tensile Strength: 3.5 lbs/inch, Elongation: 25%
- Temperature Range: -375°F to 500°F

SKU# 86020 1/2" x 520" PTFE Thread Tape- QTY 1

SKU# 86021 3/4" x 520" PTFE Thread Tape- QTY 1

SKU# 86022 1" x 520" PTFE Thread Tape- QTY 1



Pipe Wrap Tape

- Provides UV and Weather Protection
- Stretchable, strong adhesive
- Great for cast and ductile iron, galvanized steel, electrical conduit types of pipes and fittings
- Waterproof and non-corrosive
- 2" x 100 feet x 10 mil

SKU# 86080 Pipe Wrap Tape- QTY 1



UPC Pipe Wrap Tape

- Provides UV and Weather Protection
- Stretchable, strong adhesive
- Great for cast and ductile iron, galvanized steel, electrical conduit types of pipes and fittings
- Waterproof and non-corrosive
- 2" x 100 feet x 10 mil

SKU# 86081 UPC Pipe Wrap Tape- QTY 1



Duct Tape

- 8 mil, multi-purpose grade tape
- 2" x .0085" x 60 yards
- 48 mm x .210 mm x 55 m
- Excellent adhesion to a wide variety of surfaces
- Use for a broad range of applications or bundling
- Conforms well to irregular spaces

SKU# 86070 Duct Tape- QTY 1



MADE IN USA





Product not included

DryConn Counter Display

- The eye-catching display allows the customer, at a glance, to see the assortment of merchandise offered
- The QR Code is shown to educate customers about NEC Code requirements
- The booklet provides extensive information about NEC Code requirements relating to splices in wet and damp locations

SKU# RET300- QTY 1



Product not included

Peg Board Backer Panel

- 27" tall x 24" wide
- Fits over standard 1" square peg board panels
- Accepts 1/8" or 1/4" peg hooks
- Great for behind the counter product merchandising

SKU# RET350- QTY 1

6" Peg Board Hooks

SKU# RET550- QTY 1 Bag of 20



AlumiConn Poster

- 18" X 24" Poster
- Educates customer on importance of CPSC approved aluminum wiring repair
- Place anywhere to generate interest in-store

SKU# RET310- QTY 1

Metal Clip Strips

- 31" long
- Strong gripping clips hold up to 12 individual products
- Easily merchandise fast moving products such as bagged connectors, cutters, or replacement blades

SKU# RET450- QTY 1

Product not included





Side 1 Black Series Side 2 DBR/Y-600

Irrigation X-Pand


- 5' tall display with striking graphics makes a remarkable impression
- Sets up in seconds with no tools required
- Small footprint for easy display anywhere
- Educates contractors on waterproof connector requirements

SKU# RET770-QTY 1

DryConn Electrical Know the Code Poster

- 9" x 39" Poster
- Infographic style tells a story
- Educates customer with crucial NEC Code information regarding waterproof connections
- Narrow profile allows poster to be displayed anywhere

SKU# RET330 QTY 1

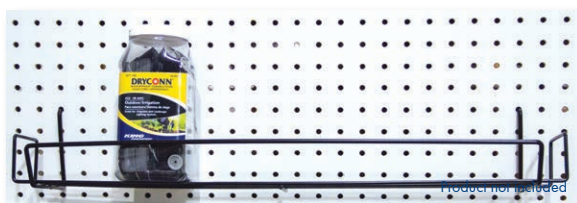

Peg Board Metal Shelf

- 24" wide x 4" deep
- Fits over standard 1" square peg board panels
- Holds all DryConn connector canister sizes
- Great for behind the counter product merchandising

SKU# RET650 QTY 1



DryConn Window Cling

- 7" long x 1.75" tall
- Double sided for viewing inside and outside of store
- Easy removal; won't leave residue on windows
- Promotes dependable DryConn® brand

SKU# RET820 QTY 1

Gondola Shelf Strips

- Approximately 24" width x 1 1/4" height
- Easily slides into most shelf channels
- Provides attractive brand identification
- Pack of two (2) shelf strips

SKU# RET850 QTY 1



GORILLA NUTS®

CUSHION GRIP WIRE CONNECTORS



Movie Poster

- Place anywhere to generate interest in-store
- 18" x 24" Poster
- Movie style poster invites attention

SKU# RET320 QTY 1



Rebate Pad

- Rebate pad offers customers a FREE hat or T-Shirt with a Gorilla Nuts purchase
- Small footprint for easy display on a counter or at the product location

SKU# RET765 QTY 1



Sticker

- Display in-store or use as customer giveaways
- Pack of twenty five (25) stickers

SKU# RET810 QTY 25



Side 1 Gorilla Nuts



Side 2 DryConn Aqua Series

Electrical X-Pand

- 5' tall display with striking graphics makes a remarkable impression
- Sets up in seconds with no tools required
- Small footprint for easy display anywhere
- Informative display keeps electricians safe and knowledgeable regarding repetitive stress injury and waterproof connections

SKU# RET780 QTY 1

MERCHANDISING ITEMS



Display Riser

- Attaches to lower shelf of RET250 display
- Riser allows 24" pump (48024) and 24" Extension Pump (48230) to be displayed

SKU# RET252- QTY 1

9" Accessory Hook

- Fits onto RET250 display without any tools or hassle
- Holds Siphon King accessory items: Syringe Sucker and Extension Hose

SKU# RET251- QTY 1

Window Cling

- Double sided for viewing inside and outside of store
- 7" long x 4.5" tall
- Easy removal; won't leave residue on windows
- Displays colorful Siphon King logo

SKU# RET825- QTY 1

Display Rack

- 25" tall x 18" wide x 18" deep
- Metal construction, assembles in seconds, no tools required
- Holds 16 Siphon King pumps
- Four sided signage allows for ease of movement and placement anywhere

SKU# RET250- QTY 1

Display shown with 8- 36" x 72" Pumps, 4- 24" x 24" pumps, 4- 24" Extension Pumps, 2- Siphon King Syringe Sucker cards and 2- 72" Extension hoses. (Product not included)

Accessory Hook



Window Cling



Display Riser

KING INNOVATION ENGINEERING HOTLINE



**GET YOUR TECHNICAL
QUESTIONS ANSWERED BY
AN ENGINEERING EXPERT!**

**CALL THE KING INNOVATION
ENGINEERING HOTLINE
877-771-8885**

Quick response to technical questions
Open Monday - Friday 8:00am - 4:00pm CST



We are **FIERCELY**
innovative

We value innovation because it is who we are and how King got started. From the King Drain to DryConn Connectors to the series of innovations in our pipeline, we believe innovation is the creation and delivery of new customer value into the marketplace.

Comments like "it can't be done" or "that will never work" are absent from our conversations at King. This way of thinking has given birth to a thriving organization after 55+ years.



We believe that **FUN**
is an integral part
of innovation and business

We believe that having fun at work is a "best practice". It is in the best interest of our customers, our employees and our company. This attitude keeps everyone on their toes and adds an element of diversity, joy, spontaneity, and a dash of healthy unpredictability to every day.



We have a deep rooted
obsession
with solving our customer's problems

We're a little geeky that way. Our customers are insanely important to us. Our customers' problems are a close second. When it comes to our customers' complications, predicaments, troubles, and problems, we humbly say, "BRING IT."



We are **PASSIONATE**
about challenging the
status quo in every
facet of our lives

It started with Lloyd King Sr when he would tell his son, Herb, "There is always a way." Today, we take that statement as a challenge to never accept the status quo as the best way. Engineering? Production? Accounting? Sales? Our Customers' Problems? It doesn't matter. We are intensely passionate about challenging the status quo.



We know that taking
personal responsibility
creates **TRUST**

We believe that taking personal responsibility for everything we do fosters a deep sense of trust with our team members, partners, and customers. We believe that Personal Responsibility is deeply American and has provided the strong foundation that our country needs to continue on its path of prosperity.



Quality is who we are

We believe that quality is an expression of how we think, who we are, how we make things, and ultimately what we offer our customers. More than just an evaluation of how good a product is or how long it lasts, we love the fact that quality starts with the way we think and we achieve excellence through continuous improvement of our products, processes, communications and services.



We have the
COURAGE
to take risks

We understand that risk taking can, well, be risky! However, we understand that without taking calculated risks, King wouldn't be where we are today. We believe that failures can be learned from and used to grow stronger.



We are all
Entrepreneurs

Entrepreneurs take personal responsibility for their work. They are always thinking about the current and future needs of their customers (both internal and external). Entrepreneurs are innovators, no matter what position they hold.

We firmly believe in the Entrepreneurial Spirit and what it does for us personally, as an organization, and ultimately for our country.



WE DON'T GIVE UP,
WE DON'T BACK DOWN,
AND WE WON'T GO AWAY

Perseverance is often defined as "steadfastness in doing something despite difficulty or delay in achieving success." We have the determination to see it through. Don't bet against us.

WIRE COMBINATIONS

DryConn Black Series

		
Black/White- 600V Min #22/Max #12 2#14 1#14 w/1-3 #18 or #20 3#16 w/1#18, #20 or #22 2-5 #18 2#14 w/1 #18 1#18 w/1-4 #20 3-5 #20 1#16 w/1 #18 4#18 w/1 #20 1#14 w/1 or 2#16 2#16 w/1-2 #18 or #20 4#20 w/1#22	Black/Gray- 600V Min #22/Max #8 1-4 #12 2#14 w/2-4 #16 1#12 w/1-4 #14 2-5 #14 1#10 w/1-3 #14 1#12 w/2-4 #18 2-6 #16 1#10 w/1-5 #16 1#14 w/3-4 #18 4#14 w/1-2 #18 1#12 w/1-4 #16 2#12 w/1-2 #14	Black/Blue- 600V Min #14/Max #6 1#6 2#8 1#10 w/3-5 #14 3#10 w/1-2 #18 2-3 #10 2#10 w/1-2 #12 4#12 w/1 #14 3-5 #12 2#10 w/1-3 #14 1#10 w/2-3 #12 3#10 w/1 #14 4, 5 or 6 #14

DryConn DBSR


DBSR Black Medium- 600V Min #22/Max #6 2#18 1-3 #10 1#14 w/3-4 #18 1-4 #12 2#14 w/2-4 #16 1#12 w/2-4 #18 2-5 #14 2-6 #16 5#14 w/1 #18 3#10 w/1 #18 1#8 w/1-2 #16, #18, #20 or #22 3#14 w/1-2 #16, #18, #20 or #22

DryConn Dry-Crimp

	
Dry-Crimp- 50V Min #18/Max #10	


DryConn HSC (Heat Shrink Crimp)


HSC- 600V Min #14/Max #4


Large ACE


Large ACE Connector- 30V Min #18/Max #8 1 or 2 #10 1,2 or 3 #12 1,2,3,4 or 5 #14 1,2,3,4,5,6,7 or 8 #16 1,2,3,4,5,6,7 or 8 #18 1 #8 w/1 #12 or #14 1 #8 w/1,2,3 or 4 #18 1 #10 w/1, 2, 3, 4, or 5 #16 2 #12 w/1 or 2 #14 2 #14 w/1, 2, 3, 4, 5, or 6 #16 2 #14 w/1, 2, 3, 4, 5, or 6 #18 5 #14 w/1 #16

Medium ACE


Medium ACE Connector- 30V Min #18/Max #8 1-2 #10 1-3 #12 1-5 #14 1-8 #16 or #18 1#8 w/1-4 #18 1#10 Stranded w/1-7 #18 Stranded 1#12 Stranded w/1-7 #18 Stranded 5#14 w/1 or 2 #18 1#8 w/1 or 2 #16 1#8 w/1 #12 or #14 1#10 w/1 or 2 #12

DryConn Low Voltage

		
Gray/Gray- 600V Min #22/Max #12 2#14 1#14 w/1-3 #18 or #20 3#16 w/1 #18, #20 or #22 2-5 #18 2#14 w/1 #18 1#18 w/1-4 #20 3-5 #20 1#16 w/1 #18 4#18 w/1 #20 1#14 w/1 or 2 #16 2#16 w/1-2 #18 or #20 4#20 w/1 #22	Blue/Blue- 600V Min #22/Max #12 1-3 #12 1-4 #14 2-5 #16 3-6 #20 2#12 w/1 #14 1#12 w/1-4 #16 or 18 2#12 w/1-2 #16 or 18 1#14 w/1-4 #16, 18 or 20 3#14 w/1 #16 3#14 w/1-2 #18 or 20 2#16 w/1-3 #18, 20 or 22 2-5 #18	Tan- 30V Min #22/Max #6 2#14 w/1-2 #12 2-6 #18 or 20 3#18 w/1-3 #12, 14 or 16 1-6 #14 or 16 1-3 #10 or 12 4#12 solid 2#16 w/1-4 #14 2#16 w/1-3 #12 2#16 w/1-2 #10 1#18 w/1-4 #12 or 14 1-2 #18 w/1-2 #10

Small ACE Connector


Small ACE Connector- 30V Min #18/Max #12 1 #12 1 or 2 #16 1 #14 w/1 #18 1 #14 1,2,3 or 4 #18 1 #16 w/1 or 2 #18

VisiLock


VisiLock- 100V Main: #8-1/0 (.363"--.625" O.D.) Tap: #12-#4 (.305"--.443" O.D.)

316 IR+


316 IR+ Min #22/Max #14

AlumiConn


AlumiConn 2 Port & 3 Port Min #18/Max #10



DB Power Connect


DB Power Connect- 600V Min #14/Max #4 4g - 14g



DryConn KSC (King Shrink Crimp)


KSC Min #18/Max #8


DryConn GTSR

	
GTSR w/Orange Nut- 50V Min #22/Max #14 1 or 2 #14 Solid or Stranded 2-3 #16 Solid or Stranded 2-4 #18 Solid or Stranded 2#14 w/1 #18 Solid or Stranded 1#16 w/1 - 4 #18 Solid or Stranded 3#18 w/1 or 2 #20 or #22 Solid or Stranded 1#16 w/1 #20 w/1 #22 2#16 w/1 or 2 #18 2#16 w/1,2 or 3 #20 1#18 w/1, 2, 3 or 4 #20	GTSR w/Yellow Nut- 50V Min #18/Max #10 4#14 Solid or Stranded 2-5 #16 Solid or Stranded 2#14 and 1 #12 Solid or Stranded 3#12 Solid or Stranded 2#16 and 2 #14 Solid or Stranded 2 or 3 #12 2,3 or 4 #14 2,3,4,5 or 6 #18 1#10 w/1,2 or 3 #16


DryConn DB-600 Silicone Tube w/Strain Relief

	
DBYN-600 w/Yellow Nut- 600V Min #22/Max #12 2 #12 2 or 3 #14 2 - 5 #16 3-7 #18 1 #12 w/1 - 4 #18 2 #12 w/1 #18 1 #14 w/1 - 4 #18 2 #14 w/1 - 3 #18 2 #16 w/1 - 3 #18	DBO/B-600 w/Orange/Blue Gorilla Nut- 600V Min #22/Max #12 1 - 3 #12 1 - 4 #14 2 - 5 #16 2-5 #18 1 #10 w/1 - 4 #18 1 #12 w/1 - 4 #18 2 #12 w/1 or 2 #18 1 #14 w/1 - 4 #18 3 #14 w/1 or 2 #18

DryConn CPC-C




	CPC-C w/Crimps 2 or 3 #10 2, 3, or 4 #12 2, 3, 4, 5, or 6 #14 or #16 2, 3, 4, 5, 6, 7, or 8 #18 1 #10 w/1, 2, 3, 4, or 5 #16	1 #10 w/1, 2, 3, 4, 5, or 6 #18 2 #10 w/1, 2, 3, or 4 #16 or #18 1 #12 w/1, 2, 3, 4, or 5 #16 1 #12 w/1, 2, 3, 4, 5, or 6 #18 3 #12 w/1, 2, or 3 #16 or #18
---	--	---

DryConn CPC-L



	CPC-L w/Lug 2 or 3 #10 2, 3, or 4 #12 2, 3, 4, 5, or 6 #14 or #16 2, 3, 4, 5, 6, 7, or 8 #18 1 #10 w/1, 2, 3, 4, or 5 #16	1 #10 w/1, 2, 3, 4, 5, or 6 #18 2 #10 w/1, 2, 3, or 4 #16 or #18 1 #12 w/1, 2, 3, 4, or 5 #16 1 #12 w/1, 2, 3, 4, 5, or 6 #18 3 #12 w/1, 2, or 3 #16 or #18
---	---	---

Contact factory for a complete list of wire combinations at 800.633.0232 or visit www.kinginnovation.com.





DryConn Aqua Series

		
Aqua/Orange- 600V Min #22/Max #12 2#14 1#14 w/1-3 #18 or #20 3#16 w/1#18, #20 or #22 2-5 #18 2#14 w/1 #18 1#18 w/ 1-4 #20 3-5 #20 1#16 w/1 #18 4#18 w/1 #20 1#14 w/1 or 2#16 2#16 w/1-2 #18 or #20 4#20 w/1#22	Aqua/Red- 600V Min #22/Max #8 1-4 #12 2#14 w/2-4 #16 1#12 w/1-4 #14 2-5 #14 1#10 w/1-3 #14 1#12 w/2-4 #18 2-6 #16 1#10 w/1-5 #16 1#14 w/3-4 #18 4#14 w/1-2 #18 1#12 w/1-4 #16 2#12 w/1-2 #14	Aqua/Blue- 600V Min #14/Max #6 2#8 1#10 w/3-5 #14 3#10 w/1-2 #18 2-3 #10 2#10 w/1-2 #12 4#12 w/1 #14 3-5 #12 2#10 w/1-3 #14 1#10 w/2-3 #12 3#10 w/1 #14 1#8 w/1 #10 1#8 w/1 or 2#12

DryConn DB-600 Silicone Tube w/Strain Relief

	
DBT-600 w/Tan Wing- 600V Min #22/Max #8 1-2 #10 2-6 #18 1-4 #12 1#8 w/ 2 #14 1-5 #14 3#12 w/ 3 #18 2-6 #16 3#14 w/2 #18 2#14 w/1 #16	DBR/Y-600 w/Red/Yellow Gorilla Nut- 600V Min #22/Max #8 2-3 #10 2#18 2-5 #12 1#8 w/1-2 #18 2-5 #14 3#10 w/ 1 #18 4-6 #16 3#12 w/3 #18 3#14 w/2 #18

DryConn Direct Bury, Telecom and Gas

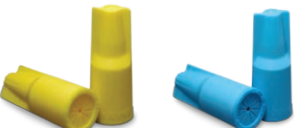			
King 4 Yellow- 600V Min #18/Max #12 4-6 #18 2-6 #16 2-5 #14 1-4 #12 2#12 w/1-2 #14 1#12 w/1-4 #14 or #16 3#16 w/2 #18 2#14 w/2-4 #16 1#10 w/1-3 #14 1#8 w/1-2 #16 1#10 w/1-2 #12 1#12 w/3 or 4#22 2#12 w/1 or 2#16 2#12 w/1 or 2#18	King 5 Red- 600V Min #14/Max #10 1-3 #10 1#10 w/1 #12 and 1-2 #14 4#14 w/1-2 #18 1-4 #12 1#12 w/1-4 #14 2-5 #14 2#12 w/1-2 #14, #16 or #18 1#10 w/1-3 #14 1#14 w/3-4 #18 2#10 w/1-2 #14 2#10 w/2 or 3 #16 2#10 w/1, 2, or 3 #18 1#12 w/3 or 4 #22 3#12 w/1 #14 3#12 w/1 or 2#16 4#14 w/1 #16	King 6 Yellow & King 6 Blue- 600V Min #22/Max #8 1-3 #10 1#10 w/1-3 #14 1#14 w/3-4 #18 1-4 #12 1#10 w/1-5 #16 2#14 w/2-4 #16 3#14 w/1-2 #16, #18, #20 or #22 2-5 #14 1#8 w/1 #12 1#12 w/1-4 #14 or #16 2#12 w/1-2 #14, #16 or #18 2-6 #16 1#12 w/2-4 #18 5#14 w/1 #18 1#8 w/1-2 #16, #18, #20 or #22 3#12 w/1 #14	King 9 Dark Blue- 600V Min #14/Max #6 1 or 2 #6 2-3 #8 2, 3, 4, or 5 #10 2 #6 w/1 #10 or 1 #12 2-5 #10 1 #6 w/ 1 or 2 #8 1 #10 w/2-4 #12 2 #6 w/1 or 2 #14 3-6 #12 1 #10 w/3-5 #14 2 #8 w/ 1 or 2 #10 2 #8 w/ 1 #10 w/ 1 #12 4 #10 w/ 1 #12 1 #6 w/ 3 #12 w/ 1 #14 3 #12 w/ 1, 2, or 3 #14 4 #12 w/1 #14

DryConn DBSR


DBSR Yellow & DBSR Aqua - 600V Min #22/Max #6 2#18 1-3 #10 1#14 w/3-4 #18 1-4 #12 2#14 w/2-4 #16 1#12 w/2-4 #18 3#14 w/1-2 #16, #18, #20 or #22 2-5 #14 2-6 #16 5#14 w/1 #18 1#8 w/1-2 #16, #18, #20 or #22 3#10 w/1 #18 1#8 w/1 #12 1#12 w/1-4 #14 or #16 2#12 w/1-2 #14, #16 or #18 1#10 w/1-5 #16 3#12 w/1 #14 1#10 w/1-3 #14


Gorilla Nuts Cushion Grip Wire Connectors

		
Orange/Blue- 600V Min #20/Max #12 3#12 4#14 2#14 2#16 2#18 3#20 1#8 3#16 w/1 #10 4#16 w/1 #14 3#20 w/2 #14	Red/Yellow- 600V Min #18/Max #8 2#8 1, 2, 3, 4 or 5 #12 1#10 w/1 or 2 #12 1, 2 or 3 #10 1#10 w/1, 2, 3 or 4 #18 2#10 w/1 #12 2#10 w/2 #16 2#18 1#6 2#10 w/ 1 or 2 #14	Blue/Gray- 600V Min #14/Max #6 2#6 5#10 6#12 2#8 5#12 3#10 4#12 3#12 4#14 4#10 w/1 #12

DryConn DB Lugs


DB Lug Yellow & DB Lug Aqua- 50V Min #14/Max #10

DryConn Split Bolt Housing

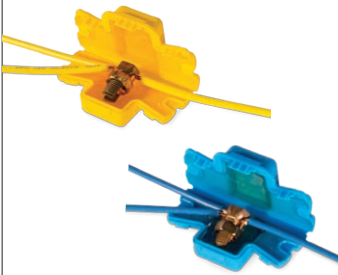
Split Bolt Housing Yellow & Split Bolt Housing Aqua- 50V Min #14/Max #10

Contact factory for a complete list of wire combinations at 800.633.0232 or visit www.kinginnovation.com.



42 N. Central Drive
O'Fallon, MO 63366

Phone: 800.633.0232

Fax: 636.519.5410

Engineering Hotline: 877.771.8885

Email: customerservice@kinginnovation.com

Websites:

www.kinginnovation.com

A thick white diagonal line runs from the bottom left towards the top right of the page.

KEEP INNOVATING