


## OWB Series

### "Weather Box" Series

**FSR**  
Metal Products Group

OWB Wall Box

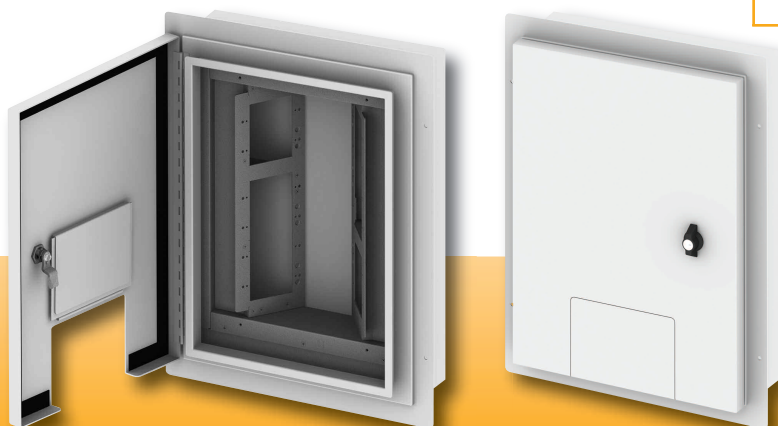

  
**WEATHER BOX™**

**The world's only outdoor wall boxes  
designed for AV and IT connections!**

#### DESCRIPTION

The new OWB-X Outdoor Wall Box series is the latest addition to FSR's metal products line. Locking doors in white are standard with other color and style options available upon request. These stylish covers have "flip up" cable entry doors so that the main cover door can be locked once the cables are connected. Two box styles are available that will allow for either flush "in wall" or surface "on wall" mounting.

The enclosures are constructed in NEMA-4 style and with the integral door will meet the NEMA-3 and 3R ratings providing protection against falling dirt, rain, sleet and snow.

The back box is currently available with four different connector mounting configurations. The internal connector mounting styles handle standard gang plates, FSR's huge assortment IPS inserts, "XLR" type connectors or a blank plate is supplied for custom fabricating by the user.

The OWB-X-GNG "gang" style back box includes factory mounted moveable high voltage dividers so that compartments containing AC line power can be isolated from low voltage and signal areas. Multiple gang arrangements are accomplished with a combination of supplied moveable dividers and spacer/filler panels.

The OWB-X3-IPS and -XLR style back boxes have tapped holes on the connector mounting plates for easy connector mounting and are painted black.

The OWB-X3-PLT style has a blank mounting plate to be punched or drilled by the user per their requirements. The depth of the plate is field adjustable.

#### FEATURES

- Safe, secure cable management
- Suitable for NEMA 3 and 3R outdoor use
- Low profile cover
- Locking cover door with key
- Surface or flush versions available
- Tapped connector mounting holes ease installation
- Custom door colors available (consult factory)
- IPS and XLR style connector plates are painted black and have room for customer provided ID name plate
- Large selection of models
- Blank plate models for custom mounting

#### APPLICATIONS

- Schools
- Hotels
- Conference Centers
- Airports
- Arenas
- Houses of Worship
- Residential
- Theme parks

#### CUSTOM OPTIONS

- Smaller sizes with display windows
- Lock options
- Depth
- Material
- Mounting
- Interior layout

**FSR**

244 Bergen Boulevard, Woodland Park, NJ 07424  
Phone: 973.785.4347 · Fax: 973.785.4207  
Web: [www.fsrinc.com](http://www.fsrinc.com) · E-mail: [sales@fsrinc.com](mailto:sales@fsrinc.com)

LIT1266

## ORDERING INFORMATION


Ordering is simple: Specify the back box style and cover style desired using the table

### STOCK MODELS


OWB-X3-SM-GNG	SURFACE MOUNT COVER. BACK BOX WITH (3) 2 GANG AND (1) 4 GANG OPENINGS IN TWO ROWS
OWB-X3-FM-GNG	FLUSH MOUNT COVER. BACK BOX WITH (3) 2 GANG AND (1) 4 GANG OPENINGS IN TWO ROWS
OWB-X3-SM-IPS	SURFACE MOUNT COVER BACK BOX WITH (36) IPS SLOTS IN 3 ROWS OF 12
OWB-X3-FM-IPS	FLUSH MOUNT COVER. BACK BOX WITH (36) IPS SLOTS IN 3 ROWS OF 12
OWB-X3-SM-XLR	SURFACE MOUNT COVER. BACK BOX WITH (32) XLR HOLES IN 4 ROWS OF EIGHT
OWB-X3-FM-XLR	FLUSH MOUNT COVER BACK BOX WITH (32) XLR HOLES IN 4 ROWS OF EIGHT
OWB-X3-SM-PLT	SURFACE MOUNT COVER. BACK BOX WITH BLANK PLATE
OWB-X3-FM-PLT	FLUSH MOUNT COVER. WITH BLANK PLATE

Discuss your custom requirements with an FSR representative.


## OWB DIMENSIONS

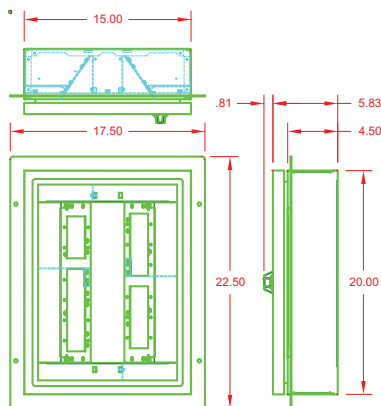


OWB-X3-FM-GNG  
DOOR NOT SHOWN ON FRONT VIEW

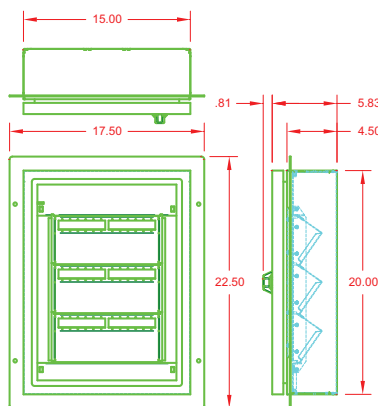

OWB-X3-FM-IPS  
DOOR NOT SHOWN ON FRONT VIEW

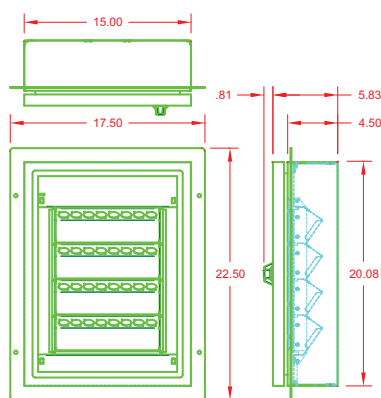

OWB-X3-FM-XLR  
DOOR NOT SHOWN ON FRONT VIEW

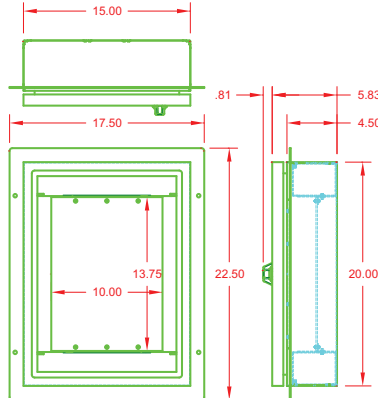

OWB-X3-FM-PLT  
DOOR NOT SHOWN ON FRONT VIEW

# NEW!

Smaller sizes with and without windows are also available.

Contact sales for ordering information.

Specifications are subject to change without notice.



# FSR

244 Bergen Boulevard, Woodland Park, NJ 07424  
Phone: 973.785.4347 · Fax: 973.785.4207  
Web: [www.fsrinc.com](http://www.fsrinc.com) · E-mail: [sales@fsrinc.com](mailto:sales@fsrinc.com)