

The Premium Choice in Landscape Lighting™



Lighting that defines your style™

KICHLER
LIGHTING 

Low Voltage

Path & Spread

Let stylish design and durable construction light the way.

Enhance an outdoor environment's beauty and safety with Kichler's wide array of path and spread lights. Each is designed to integrate into the landscape architecture and shed soft, balanced lighting where it's wanted, without troublesome glare or hot spots.

Stylish designs:

- Choose traditional, low-profile designs for an unobtrusive look — or decorative path lights designed to be noticed
- Available in a wide range of finishes to complement any setting

Durable construction:

- High-quality materials assure years of trouble-free enjoyment
- Kichler's signature finishes, including new copper selections, unique glass colors and creative use of texture create a lasting impression of quality and style





15379 OZ

GATE HOUSE

Classic estate styling.

Housing Brass

Finish Olde Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input
VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 34" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
14" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent No. D561,371

See matching Gate House™ Collection on page 22-23



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	8.16	3.43	3.43	1.46	.33	—	—	—	—



15446 OZ

ARIES MANOR™

An elegant and stately path light featuring solid brass construction, a turned spindle stem.

Housing Brass with cocoa turned marble accent. Citrine glass.

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input
VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Aries Manor™ Collection on page 14-15



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	0.5	1.1	0.8	0.4	0.1	0	—	—	—



15447 OZ

ARIES MANOR™

An elegant and stately indirect path light featuring solid brass construction and a turned spindle stem.

Housing Brass with cocoa turned marble accent.

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input
VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

 
Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Aries Manor™ Collection on page 14-15



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	6.9	4.9	2.9	1.3	0.4	0.1	—	—	—



15314 MST

15314 AZT

SINGLE-TIER LEAF

Delicate leaf form casts a warm, diffused light along a walkway or near an entryway.

Housing Aluminum

Finish Textured Architectural Bronze or Textured Midnight Spruce

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	2.6	3.2	1.2	.5	.2	–	–	–	–



15436 OZ

INTAGLIO BRASS CROOK NECK

A richly detailed solid and heavy crookneck path light with a brass shade that has been engraved and etched with an organic pattern.

Housing Brass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 26" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	8.9	5.3	2.1	0.5	.02	0	–	–	–



15347 VGB

AINSLEY SQUARE

Pierced brass dome and stem and verdigris finish for stylish path lighting.

Housing Brass

Finish Verdigris with Aged Brass

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 32" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Ainsley Square™ Collection on page 20-21



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	2.7	1.1	.3	.2	–	–	–	–	–



15348 VGB

AINSLEY SQUARE BOLLARD

Pierced brass etchings surrounding illuminated center create intricate light patterns on pathways, topped with a classic lantern.

Housing Brass with etched seeded glass

Finish Verdigris with Aged Brass

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023) (2)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
14" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent No. D578,239

See matching Ainsley Square™ Collection on page 20-21



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	.76	.63	.1	–	–	–	–	–	–



15369 TZT

VINTAGE PARK

Graceful curves and elegant detailing in a vintage design.

Housing Aluminum with tea dust glass

Finish Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)

Supplied: 18.5-W(VA) 3155K (15599 CLR)

 
Wiring 32" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent No. D570,517

See matching Vintage Park™ Collection on page 24-25



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	10.13	4	.9	.1	–	–	–	–	–



15393 OZ

KENTUCKY

Classic path light tastefully captures the traditional hunt club style.

Housing Brass with light linen glass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

 
4-W(VA) 901X (17021)

Wiring 41" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	6"	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	8.96	2.6	.43	.13	–	–	–	–	–



15426 BKT

ALMERIA™

Graceful curves and elegant detail are silhouetted by a tawny glow for a classic elegant look emulating Mediterranean sophistication.

Housing Aluminum and Brass with light amber glass

Finish Textured Black

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 11.6-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 34" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent No. D578,238

See matching Almeria™ Collection on page 16-17



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	10	5.2	.8	.2	–	–	–	–	–



15422 AGZ

COTSWOLD™

Curvy edition with old world charm, this path light spreads light with style that blends into nature for lower profile light source.

Housing Aluminum

Finish Aged Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

 
VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 26" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

See matching Cotswold™ Collection on page 18-19



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	8.8	7	3.6	1.4	.4	–	–	–	–



15420 AGZ

COTSWOLD™

Lantern style path light with an old world, curvy cap. Available with garden gnome (15440 AGZ) or without (as shown). A curly stem adds unique charm to a popular traditional look.

Housing Aluminum with weathered white glass

Finish Aged Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 28" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

Patent Pending in U.S. and Canada

See matching Cotswold™ Collection on page 18-19



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	14.9	2.5	1.3	.5	.1	–	–	–	–



15440 AGZ

COTSWOLD™ GARDEN GNOME

Heavy duty whimsical figure appears to be holding lantern path light (15420 AGZ). Inspired by passionate gardeners with a fondness for all things gnome.

Housing Aluminum with weathered white glass
Resin figure

Finish Aged Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
4-W(VA) 901X (17021)

Wiring 28" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

(2) 8" In-ground stakes

Patent Pending in U.S. and Canada

See matching Cotswold™ Collection on page 18-19



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	14.9	2.5	1.3	.5	1	—	—	—	—



15421 AGZ

COTSWOLD™ CONVERTIBLE HEIGHT TIKI

Adjustable-height stem converts path light to a Tiki torch style for use around patios, barbeque grills or outdoor dining areas.

Housing Aluminum with weathered white glass

Finish Aged Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads.
Cable connector supplied with fixture.


Mounting Accessories Included

14" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

See matching Cotswold™ Collection on page 18-19

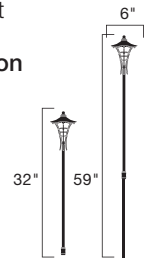


Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	.25	.3	.2	.1	—	—	—	—	—

New

SPRING 09

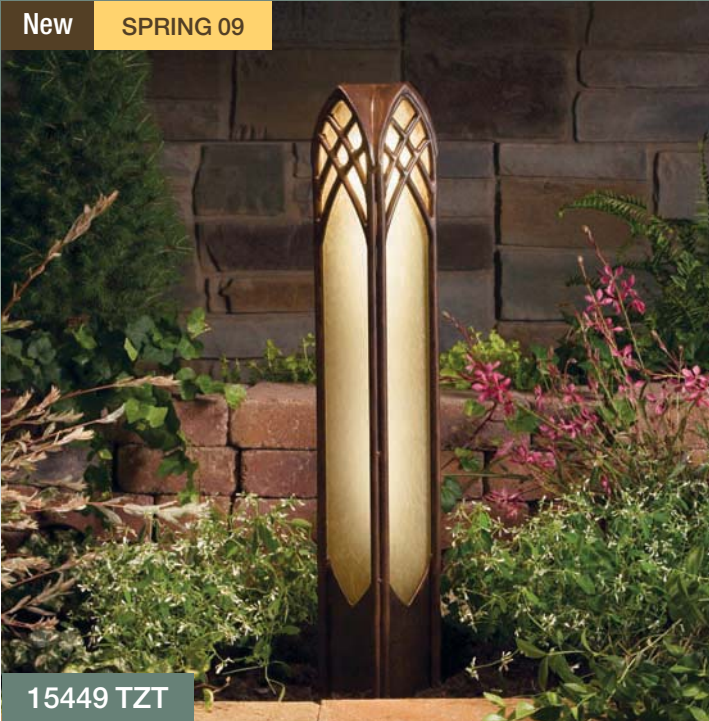

15449 TZT

CATHEDRAL™ BOLLARD

Cathedral arches and interwoven bands created to form a transitional stanchion for the garden's edge.

Housing Aluminum with dark citrine glass

Finish Textured Tannery Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
 Supplied: 11.6-W(VA) 912X (17023) (2)
 Optional: 16.25-W(VA) 921X (17025)
 6.5-W(VA) 918X (17022)
 4-W(VA) 901X (17021)
 (2 required)

 
Wiring 24" of usable #18-2, SPT-1-W leads.
 Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

See matching Cathedral™
 Collection on page 10-11

U.S. Patent Pending




Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	0.44	1.81	1.26	0.70	0.39	0.25	0.16	.012	0.10

New

SPRING 09

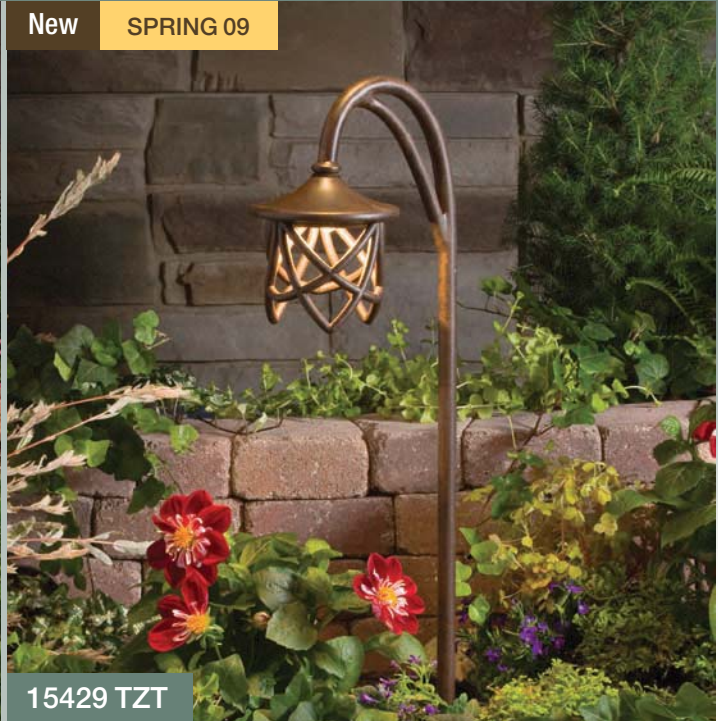

15429 TZT

CATHEDRAL™

Transitional styling with draped arches of interwoven bands.

Housing Aluminum

Finish Textured Tannery Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
 Supplied: 11.6-W(VA) 912X (17023)
 Optional: 16.25-W(VA) 921X (17025)
 6.5-W(VA) 918X (17022)
 4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads.
 Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
 15607 – Tree/Surface Mounting Bracket

See matching Cathedral™
 Collection on page 10-11

U.S. Patent Pending




Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	7.52	5.42	0.47	1.15	0.32	0.05	–	–	–

New

SPRING 09

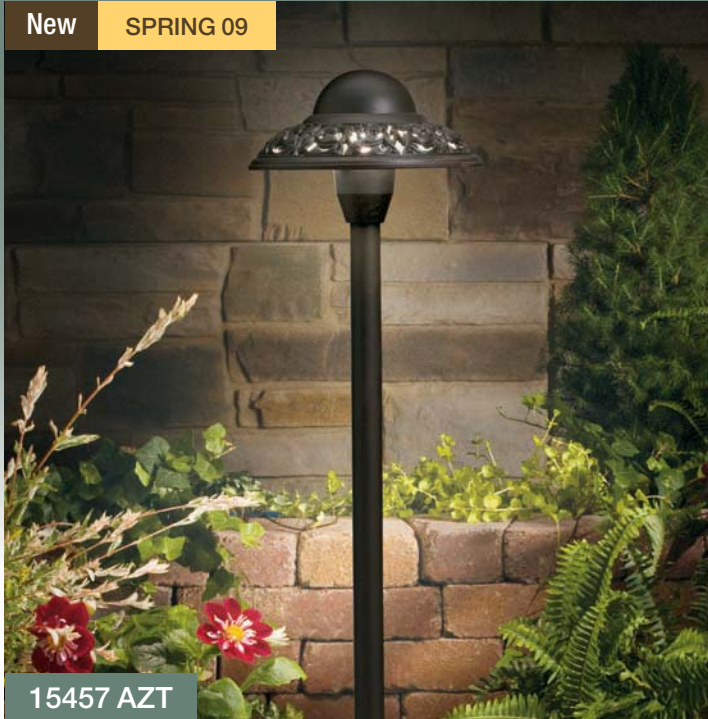

15457 AZT

PIERCED DOME

A cast dome sculpted with a floral band and pierced to reveal a trickle of light.

Housing Aluminum

Finish Textured Architectural Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

 
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	9.36	5.22	3.76	2.02	0.89	0.12	0.05	–	–

New

SPRING 09



15437 TZT

PIERCED SCROLLWORK

Classic style scrollwork is pierced and shaped into a pyramid allowing the light to play against the sculpted textures.

Housing Aluminum

Finish Textured Tannery Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

 
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	11.04	6.99	3.14	1.56	0.44	0.10	0.05	0.03	–



15330 OZ

ADJUSTABLE CRESCENT

Adjustable shade on this versatile fixture allows it to be used as a path or accent light or for wall washing.

Housing Adjustable brass shade

Finish Olde Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 42" of usable #18-2, SPT-1-W leads. Cable connector supplied.


Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

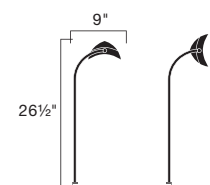

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	15.18	9.98	4.13	1.52	.6	.22	.03	–	–



15332 OZ

FROG AT PLAY

A mixture of whimsy and function creates a clever accent near a pond or along a path.

Housing Brass

Finish Olde Brass®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)

Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 23" of usable #18-2, SPT-1-W leads. Cable connector supplied.


Mounting Accessories Included

14" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

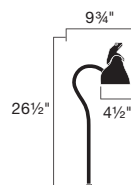

Photometric with Lamp Supplied (fc)

Distance from Light	.5'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	13.5	8.3	3.8	1.7	.8	.4	.1	–	–



15307 CO

FROG AND UMBRELLA

Weathered verdigris frog perched under an umbrella to accent a path or sit in the landscape.

Housing Copper stem and umbrella. Composite resin frog.

Finish Unfinished copper with verdigris

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 34" of usable #18-2, SPT-1-W leads. Cable connector supplied.


Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

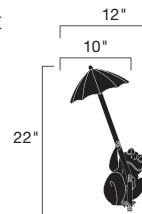

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	21.1	7.3	1.7	.7	.5	–	–	–	–



15316 CO

UMBRELLA

Simple styling and classic copper finish create elegant simplicity.

Housing Copper

Finish Unfinished copper

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	23.3	11	3	2	–	–	–	–	–



15325 PZ

15324 PZ

LEAF WITH OR WITHOUT LIZARD

Organic leaf design integrates naturally into any garden setting as a path light. Add the lizard to create a unique focal point.

Housing Die-cast zinc shade and brass stem. Lizard made of composite resin.

Finish Patina Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)


Wiring 41" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

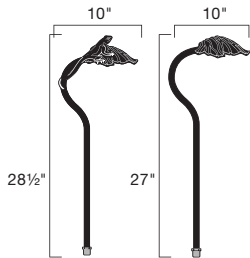

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	22.4	13.1	5.4	2	.8	.3	.1	–	–



15358 OZ

15359 OZ

ACORN WITH OR WITHOUT SQUIRREL

Available with or without squirrel to create a strategically placed accent light and maintain a coordinated look.

Housing Brass and linen glass. Squirrel made of durable outdoor resin.

Finish Olde Bronze® with Textured Weatherstone squirrel

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 16.25-W(VA) 921X (17025)
Optional: 11.6-W(VA) 912X (17023)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)


Wiring 38" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

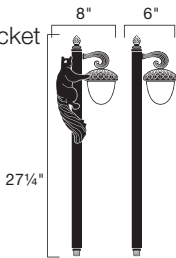

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	11.3	8.1	3.7	1.7	.7	.3	.1	–	–

U.S. Patent Pending



15342 TZT

DECORATIVE CATTAIL

Cattail design adds a natural look to the landscape. Flared shade with white interior illuminates outward for excellent pathway lighting.

Housing Brass

Finish Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent No. Des. 354,366



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	13.4	4.55	1.65	.58	.13	—	—	—	—

New SPRING 09



15401 TZT

THATCHED ROOF

The casual style indicative of island life is reproduced in this cast aluminum lighting fixture. Coordinates with matching deck light 15461 on page 85.

Housing Aluminum with clear glass sprinkler shield

Finish Textured Architectural Bronze

Light Source 12V Incandescent bi-pin, high temperature porcelain socket

Power Usage at 12V AC Input

VA MAX: 20-W(VA)

Supplied: 20-W(VA) T-3 (17012) halogen

Optional: 10-W(VA) T-3 (17011)

Wiring 20" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	9.9	7.3	1.7	.76	.16	—	—	—	—



15373 BKT

TEXTURED TREE BARK

Combines traditional shapes with natural textures for a popular lodge style.

Housing Resin and Aluminum

Finish Textured Black

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)

Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 23" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	6.93	4.33	.15	—	—	—	—	—	—



15443 TZT



15443 VG



15443 OB / 15943 OB6
15443 NBK



15443 CO



New

SPRING 09

15418 AZT

DECORATIVE HAMMERED ROOF

Pierced shade sheds decorative patterned light over shrubs or gardens. Coordinates with matching deck light 15063 on page 85.

Housing Brass or Copper

Finish Polished Copper, Olde Brick®, Natural Verdigris, New Brick or Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

Ordering Guide

15443 CO Polished Copper, Copper

15443 OB Olde Brick®, Brass

15943 OB 6 Same as 15343OB. Bulk packed in 6 (unbreakable master) with 25' of 16-gauge wire and Universal Connector for LV Junction.

15443 OB 12 Same as 15343OB. Bulk packed in 12 (unbreakable master).

15443 NBK New Brick™, Brass, powder coat version of Olde Brick®

15443 TZT Textured Tannery Bronze®, Brass

15443 VG Verdigris, Brass

U.S. Patent No. Des. 408,573

Also available with an LED light source.

See 15843 on page 32.

Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	8.9	2.8	.6	.15	–	–	–	–	–



RIBBED ROOF

Simple ribs and valleys are combined with a fluted column to blend with every landscape setting and any home exterior. Coordinates with matching deck light 15468 on page 95.

Housing Aluminum with clear glass sprinkler shield

Finish Textured Architectural Bronze

Light Source 12V Incandescent bi-pin, high temperature porcelain socket

Power Usage at 12V AC Input

VA MAX: 20-W(VA)

Supplied: 20-W(VA) T-3 (17012) halogen

Optional: 10-W(VA) T-3 (17011)

Wiring 20" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Light Bulb Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	11.7	5.4	1.1	.2	–	–	–	–	–





15349 MST

TULIP

Traditionally elegant tulip shade on a gracefully curved stem. Effective as a grouping in a flower bed or along a path.

Housing Aluminum

Finish Textured Midnight Spruce™


Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input
VA MAX: 18.5-W(VA)
Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 37" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

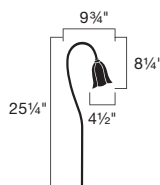

Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	12.7	4.1	1	.2	.07	.02	—	—	—



15320 OZ

TIFFANY PETALS

Elegant flower petals recreated in Tiffany-style glass on a sweeping stem accented by a single leaf. Olde Bronze® finish adds to the look of an aged heirloom.

Housing Brass. Tiffany-style glass shade. Glass colors may vary slightly due to production methods.

Finish Olde Bronze®


Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input
VA MAX: 18.5-W(VA)
Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 38" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

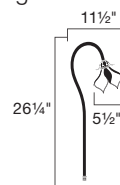

Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	9.7	4.7	2	.8	.3	.1	—	—	—



15313 TZG

LAFAYETTE™ LANTERN

A traditional lantern with French influence for a distinctive look. Matching 120V surface and post mount styles available.

Housing Aluminum. Linen seeded glass.

Finish Tannery Bronze® with Gold Accents

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input
VA MAX: 16.25-W(VA)
Supplied: 16.25-W(VA)
Optional: 11.6-W(VA) 912X (17023)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	1.3	3	1.96	.86	.33	—	—	—	—

U.S. Patent Pending



15453 AZT — p49



15445 OZ

LARKIN ESTATE™ CENTERPIECE

Classic prairie styling employing a rich dark bronze finish and warm amber glass.

Housing Brass with amber etched glass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 32" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

14" In-ground stake

 
Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Larkin Estate Collection on page 12-13



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	0.8	1.0	1.2	.05	0.3	0.2	—	—	—



15444 OZ

LARKIN ESTATE™

Classic prairie styling employing a rich dark bronze finish and warm amber glass.

Housing Brass with amber etched glass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 40" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Larkin Estate Collection on page 12-13



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	10.8	6.9	0.7	0.4	0.2	0.1	—	—	—



15304 RC

ORIENTAL

Tall and graceful pierced lantern for use as an accent light or along a walkway. Stunningly original Red Copper finish.

Housing Brass

Finish Red Copper

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)

Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 46" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	3.2	.5	.03	—	—	—	—	—	—



15453 AZT

MISSION SLATE

The beauty of slate and the richness of mission aesthetics come together to create this exciting garden statement.

Housing Aluminum and natural, cut slate panels

Finish Textured Architectural Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 46" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

 
15601 – Surface Mounting

Flange

15607 – Tree/Surface Mounting

Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	7.83	5.14	1.45	0.34	0.07	0.03	0.02	—	—



15391 OZ

ZEN GARDEN

Path lighting with Far Eastern style and amber glass offers soft light with good spread for illuminating paths and walkways.

Housing Brass with textured amber seedy linen glass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W(VA) 912X (17023)
Optional: 16.25-W(VA) 921X (17025)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

 
Wiring 30" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Zen Garden Collection on page 26-27



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	3.2	1.2	.26	–	–	–	–	–	–



15392 OZ

ZEN GARDEN BOLLARD

Bollard lighting with Far Eastern style and amber glass for soft lighting along a path.

Housing Brass with textured amber seedy linen glass

Finish Olde Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)
Supplied: 11.6-W 912X (17023)
Optional: 16.25-W(VA) 921X (17025)

 
Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

See matching Zen Garden Collection on page 26-27



Photometric with Lamp Supplied (fc)

Distance from Light	.5'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	.16	.36	.20	–	–	–	–	–	–



15319 PZ

MISSION LANTERN

California mission-style with frosted glass coordinates with contemporary, craftsman or Southwest architecture. Coordinates with matching post light 15048 PZ on page 91.

Housing Brass with satin-etched glass

Finish Patina Bronze

Light Source 12V Incandescent S-8 wedge base socket

 
Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)
Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 40" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	21.1	7.3	1.7	.7	.5	–	–	–	–



15322 AGZ

CROSS CREEK LANTERN

Arts and crafts style in a path light for distinctive simplicity. Matching 120V surface and post mount styles available.

Housing Aluminum with textured linen seeded glass panels

Finish Aged Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included


8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent No. D580,084

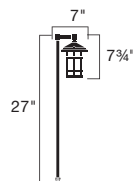

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	10.8	6.9	0.7	0.4	0.2	0.1	—	—	—



15365 CV

LA MESA LANTERN

Arts and crafts-inspired light complements any architectural style. Matching 120V surface and post mount styles available.

Housing Solid Brass with Honey opalescent glass. Glass panel colors may vary due to production methods.

Finish Canyon View™

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 21" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

 
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	3.2	.5	.03	—	—	—	—	—	—



15458 OZ

MISSION BOLLARD

The broad roof indicative of mission styling is blended into a garden bollard with honey beige glass.

Housing Brass with honey beige glass

Finish Old Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023) (qty 2)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

 
4-W(VA) 901X (17021)

(2 required)

Wiring 22" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	0.44	1.81	1.26	0.70	0.39	0.25	0.16	0.12	0.10



15430 CO

SANTA BARBARA™ SMALL COPPER

Durable, sleek and basic, low profile with surprising light throw. Ages outdoors gracefully over time by turning verdigris. Coordinates with 15431 CO.

Housing Copper with stainless steel inner roof and clear glass

Finish Unfinished copper

Light Source 12V Incandescent bi-pin, high temperature porcelain socket

Power Usage at 12V AC Input

VA MAX: 10-W(VA)

Supplied: 10-W(VA) T-3 (17011) halogen

Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	11.5	5	2.9	.8	.2	—	—	—	—



15431 CO

SANTA BARBARA™ LARGE COPPER

Influenced by Southern California, this wider spread path ages outdoors gracefully over time by turning verdigris. Coordinates with 15430 CO.

Housing Copper with stainless steel inner roof and clear glass

Finish Unfinished copper

Light Source 12V Incandescent bi-pin, high temperature porcelain socket

Power Usage at 12V AC Input

VA MAX: 20-W (VA)

Supplied: 20-W (VA) T-3 (17012) halogen

Optional: 10-W(VA) T-3 (17011)

Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	31.5	11.7	5.4	1.1	.2	—	—	—	—



15351 CO

COPPER CENTER MOUNT

This classic brushed copper path light develops a natural verdigris patina over time.

Housing Copper

Finish Unfinished copper

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake and 18" stem

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	17.4	4.3	1.2	—	—	—	—	—	—
18"	10.4	5.2	1.9	.83	.23	—	—	—	—
24"	5.1	5.2	2.2	1	.5	.17	—	—	—

Light Bulb Conversion: 18.5W, 3155K Light Bulb, FCx66

New

SPRING 09



15455 CO

TRANSITIONAL COPPER LARGE

The deep domed transitional design roof will age into a beautiful patina as the copper oxidizes.

Housing Copper

Finish Unfinished copper

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 39" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	17.45	8.73	3.86	2.37	1.08	0.58	0.34	0.15	0.05

New

SPRING 09



15454 CO

TRANSITIONAL COPPER SMALL

The deep domed transitional design roof will age into a beautiful patina as the copper oxidizes.

Housing Copper

Finish Unfinished copper

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 40" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	8.64	4.02	2.59	1.26	0.38	0.10	0.05	0.03	—



15350 CO

ADJUSTABLE COPPER

The adjustable top shade of this traditional style light offers versatility in light spread and will develop a natural verdigris patina over time.

Housing Copper

Finish Unfinished copper

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W (15599 CLR)

Wiring 21" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Shade Position on Stem	1'	2'	3'	4'	5'	6'	7'	8'	9'
Bottom	6.4	5.0	2.3	1.0	.4	.1	—	—	—
Middle	6.3	2.7	2.0	.9	.4	.1	—	—	—
Top	6.0	2.4	.8	.3	.1	—	—	—	—

Distance from surface 19"



15367 TZT

ROUND LANTERN

Simple, elegant style blends with traditional or contemporary architecture.

Housing Aluminum with etched sunset glass

Finish Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

 
Wiring 51" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	5.03	3.18	1.45	.68	.3	.13	.03	–	–



15438 OZ

TRADITIONAL MARINE LANTERN

Traditional marine lantern for well-shielded illumination in a variety of finishes. Matching 120V surface and post mount styles available on page 187.

Housing Brass or Copper with white polycarbonate diffuser

Finish Polished Copper, Olde Brick®, Olde Bronze® or Natural Verdigris

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)
Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 26" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

 
Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

Ordering Guide

15438 CO Polished Copper, Copper
15438 OB Olde Brick®, Brass
15438 OB 4 Same as 15438 OB. Bulk packed in 4 (unbreakable master).
15438OZ Olde Bronze®, Brass
15438VG Verdigris, Brass

U.S. Patent No. Des. 383,237



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	2.9	1.2	.3	–	–	–	–	–	–

New

SPRING 09



15450 TZT

MICA MISSION

A mission style roof combined with glass designed to replicate the umber glow of mica for a warm comfortable exterior look.

Housing Cast Aluminum and mica finished glass

Finish Textured Tannery Bronze®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 11.6-W(VA) 912X (17023)

Optional: 16.25-W(VA) 921X (17025)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 24" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	1.34	1.61	1.63	0.86	0.46	0.28	0.07	0.07	—



15352 OZ

TRADITIONAL LANTERN

Classic elegance complimented by etched seedy glass reminiscent of traditional craftsmanship.

Housing Brass with etched seedy glass

Finish Olde Bronze® or Natural Verdigris

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 18.5-W(VA)

Supplied: 18.5-W(VA) 3155K (15599 CLR)

Wiring 21" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

Ordering Guide

15352 OZ Olde Bronze®

15352 OZ 6 Same as 15352 OZ.

Bulk packed in 6 (unbreakable master)

15352 VG Verdigris

U.S. Patent No. Des. 420,160



15352 VG



Photometric with Lamp Supplied (fc)

Distance from Light	.5'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	2.7	1.3	.3	.1	—	—	—	—	—



15334 OB

CONCORD LANTERN

Revolutionary design adds an early colonial flair to formal settings. Matching 120V surface and post mount styles available on page 187.

Housing Brass with stainless steel rods and seedy glass

Finish Olde Brick®

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 6.5-W(VA)

Supplied: 6.5-W(VA) 918X (17022)

Optional: 4-W(VA) 901X (17022)

 
Wiring 20" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	20.9	4.7	.6	.2	—	—	—	—	—



“Art is not what you see, but
what you make others see.”

Edgar Degas – Artist



15435 PP



15435 RD



15435 AMB

POSIES

Dense purple, deep cranberry red and golden amber glass flowers will seamlessly blend into a flowerbed during the day and provide the punch of light needed in the evening. Mix or match colors or use the special mounting accessory to create an innovative centerpiece with different angles and heights.

Housing Brass

Finish Olde Bronze® with Dense Purple, Cranberry Red or Golden Amber glass

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 3/4" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

15635 OZ – Three-Fixture Centerpiece Mounting Kit

U.S. Patent Pending

 


15635 OZ

15635 OZ – Three-Fixture Centerpiece Mounting Kit

The kit allows for the creation of an interesting garden centerpiece that replicates nature with Posies installed at an angle at varying heights.

Can also be used to install three fixtures at the same height. Colors may be mixed or uniform. Kit includes a mounting plate, 14" In-ground stake for added stability, a 3" Olde Bronze® stem section and the necessary hardware and instructions to make a truly creative garden feature.



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	4.9	3.1	3.1	1.3	0.5	0.2	–	–	–



15317 BN

15317 AZT

15318 AZT

GLASS & METAL

A sleek, modern original that combines contemporary style with smooth illumination.

Housing Aluminum (AZT) or Brass (BN) with glass diffuser

Finish Textured Architectural Bronze or Brushed Nickel

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input
 VA MAX: 24.4-W(VA)
 Supplied: 24.4-W(VA) 3156K (15598 CLR)
 Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
 8" In-ground stake

Optional Mounting Accessories
 15601 – Surface Mounting Flange
 15607 – Tree/Surface Mounting Bracket

U.S. Patent No. Des. 406,374



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	9.4	4.8	2	.72	.32	.16	–	–	–

GALAXY

Sophisticated, modern style in an understated fixture.

Housing Aluminum

Finish Textured Architectural Bronze

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input
 VA MAX: 24.4-W(VA)
 Supplied: 24.4-W(VA) 3156K (15598 CLR)
 Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
 8" In-ground stake

Optional Mounting Accessories
 15601 – Surface Mounting Flange
 15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	2.6	3.2	1.2	.5	.2	–	–	–	–



15360 AZT

SIMPLICITY SIDE MOUNT

Simple, uncomplicated design for perfect illumination along paths without troublesome glare.

Housing Aluminum

Finish Textured Architectural Bronze

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads.
Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	.5'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	20.7	10.6	3.5	1.1	.4	.1	–	–	–



15442 AZT

TEXTURED AND HAMMERED

Textured and smooth Architectural Bronze® finishes are combined with hammered and flat surfaces to provide subtle variations in tone, texture and appeal.

Housing Aluminum with umber-etched glass

Finish Architectural Bronze and Textured Architectural Bronze

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 16.25-W(VA)

Supplied: 16.25-W(VA) 921X (17025)

Optional: 11.6-W(VA) 912X (17023)

6.5-W(VA) 918X (17022)

4-W(VA) 901X (17021)

Wiring 26" of usable #18-2, SPT-1-W leads.

Cable connector supplied. 12V wedge base socket.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	7.8	3.9	1.7	0.7	0.2	0	–	–	–

U.S. Patent Pending

New

SPRING 09



15411 AZT

15411 SA

CONTEMPORARY ARCH

A rounded dome diffuser is supported by an arched column that bisects a clean, straight upright for a contemporary look that gently fits in international style gardens and beyond.

Housing Aluminum

Finish Textured Architectural Bronze or Satin Aluminum

Light Source 12V Incandescent T-5 wedge base socket

Power Usage at 12V AC Input

VA MAX: 6.25-W(VA)
Supplied: 6.25-W(VA) 921X (17025)
Optional: 11.6-W(VA) 912X (17023)
6.5-W(VA) 918X (17022)
4-W(VA) 901X (17021)

Wiring 30" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

Photometric with Lamp Supplied (fc)

Distance from Light	.6'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	30.30	18.17	7.20	3.16	1.37	0.70	0.39	0.27	0.17



15333 TZT

CONTOURS

A fresh interpretation of contemporary style. Equally effective as a path light or to highlight a flower bed.

Housing Aluminum

Finish Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 34" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

U.S. Patent Pending

Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	11.9	6.6	2.58	.88	.28	–	–	–	–



15327 BR

15327 BBR

CAST BRASS

Engineered to withstand harsh coastal conditions, brass is the premium choice over aluminum.

Housing Brass

Finish Brass or Bronzed Brass

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included
8" In-ground stake

Optional Mounting Accessories
15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket
15677 CLR – Lens Accessory

Also available with an LED light source. See 15827 BBR on page 33.

Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	55.3	27.67	8.37	2.53	.83	.47	.33	.33	–



15439 TZT

15439 CO

15439 OB

FUNDAMENTALS

Basic, uncomplicated design for versatility. Use along walkways or points of interest.

Housing Brass or Copper. Shade painted white inside.

Finish Polished Copper, Olde Brick® or Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket


Ordering Guide

15439 CO Polished Copper, Copper
 15439 OB Olde Brick®, Brass
 15439 OB 6 Same as 15439 OB. Bulk packed in 6 (unbreakable master).
 15439 TZT Textured Tannery Bronze®, Brass



Photometric with Lamp Supplied (fc)

Distance from Light	0'	1'	2'	3'	4'	5'	6'	7'	8'
Footcandles	13.4	4.55	1.65	.58	.13	–	–	–	–

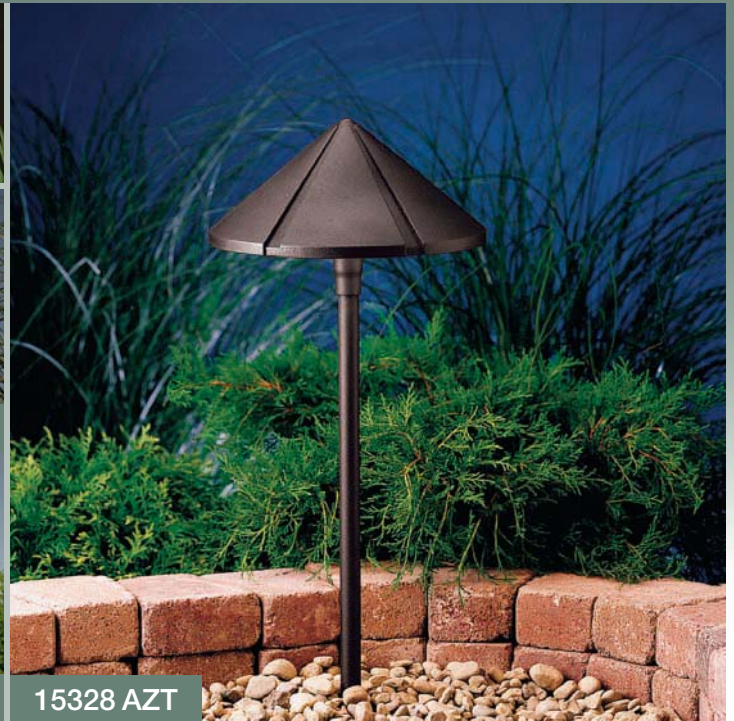

15328 AZT

LARGE CENTER MOUNT

Wide head for broad light spread to highlight beds and paths. Textured Architectural Bronze® finish blends with landscape.

Housing Aluminum

Finish Textured Architectural Bronze

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.


Mounting Accessories Included

8" In-ground stake and 18" stem

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

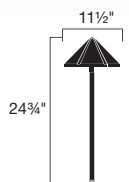

Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	20.8	4.1	.27	–	–	–	–	–	–
18"	12.1	5.6	1.8	.67	–	–	–	–	–
24"	8.3	5.8	2.2	.97	.48	.02	–	–	–

*Light Bulb Conversion:
 18.5W, 3155K Light Bulb,
 FCx66



THREE TIER

Louvers direct tiers of light downward for well-shielded, dramatic lighting. Blends nicely with shrubs or flowers along a pathway. Available in stem or deck mount or as a bollard. Mounting stems and bollard kits sold separately.

Housing Aluminum with molded ribbed diffuser of clear UV stabilized high impact resistant polycarbonate

Finish Textured Architectural Bronze, Textured Black or Textured Midnight Spruce™

Light Source 12V Incandescent S-8 wedge base socket


Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 52" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Optional Mounting Accessories

15656, 15657, 15658 or 15570 – Stems
15575 BK, 15576 BK or 15578 – Stakes
15665, 15666 or 15667 – Bollard
15671 ST – Bollard Template Kit
15601 – Surface Mounting Flange
15602 – Flange Mounting Nipple
15607 – Tree/Surface Mounting Bracket

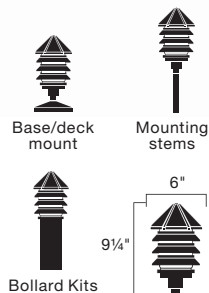

Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	2.1	.93	.67	.18	–	–	–	–	–
18"	1.8	.73	.4	.27	0.3	–	–	–	–
24"	1.2	.67	.33	.35	.27	.15	–	–	–

Light Bulb Conversion: 18.5W, 3155K Light Bulb, FCx.66

SIDE MOUNT

A popular design in a side-mount fixture for more directional lighting without glare.

Housing Aluminum

Finish Textured Architectural Bronze, Beach, Textured Black or Textured Midnight Spruce™

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)
Supplied: 24.4-W(VA) 3156K (15598 CLR)
Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

Mounting Accessories Included 8" In-ground stake and 18" stem

 
Optional Mounting Accessories

15601 – Surface Mounting Flange
15607 – Tree/Surface Mounting Bracket

Optional Lens Accessories 15695 CLR – Lens

Ordering Guide

15315 AZT Textured Architectural Bronze
15315 AZT 6 Same as 15315 AZT. Bulk packed in 6 (unbreakable master).
15915 AZT 6 Same as 15315 AZT. Bulk packed in 6 (unbreakable master) with 25' of 16-gauge wire and Universal Connector (supplied) for use with LV Junction.
15315 BE Beach
15315 BKT Textured Black
15315 MST Textured Midnight Spruce™



Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	18.7	4.3	1.4	.27	–	–	–	–	–
18"	15	5.2	1.8	.8	.27	.03	–	–	–
24"	11.6	5.1	2.2	.97	.48	.2	.07	–	–

Light Bulb Conversion: 18.5W, 3155K Light Bulb, FCx.66

Also available with an LED light source. See 15815 on page 32.



CENTER MOUNT

Unobtrusive, center mount fixture for maximum light spread.

Housing Aluminum

Finish Textured Architectural Bronze, Beach, Textured Black or Textured Midnight Spruce™

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads.

Cable connector supplied.

Mounting Accessories Included

8" In-ground stake and 18" stem

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket

Ordering Guide

15326 AZT Textured Architectural Bronze

15326 AZT 6 Same as 15326 AZT. Bulk packed in 6 (unbreakable master).

15926 AZT 6 Same as 15326 AZT. Bulk packed in 6 (unbreakable master) 25' of 16-gauge wire and Universal Connector (supplied) for use with LV Junction.

15326 BE Beach

15326 BKT Textured Black

15326 MST Textured Midnight Spruce



Also available with an LED light source. See 15826 on page 33.

Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	21.8	5.3	1.5	.1	–	–	–	–	–
18"	16.6	6.3	2.2	.87	.1	–	–	–	–
24"	7.9	6.1	2.7	1.2	.55	.2	–	–	–

Light Bulb Conversion: 18.5W, 3155K Light Bulb, FCx.66

ONE TIER

Versatile fixture with wider light distribution for paths and low areas of groundcover. Louver inverts to create more indirect light spread. Mounting stems and bollard kits sold separately.

Housing Aluminum with molded ribbed diffuser of clear UV stabilized high impact resistant polycarbonate

Finish Textured Architectural Bronze, Textured Black or Textured Midnight Spruce™

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 52" of usable #18-2, SPT-1-W leads.

Cable connector supplied.

Optional Mounting Accessories

15656, 15657, 15658 or 15570 – Stems

15575 BK, 15576 or 15578 BK – Stakes

 
15665, 15666 or 15667 – Bollard

15671 ST – Bollard Template Kit

15601 – Surface Mounting Flange

15602 – Flange Mounting Nipple

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Stem Height	1'	2'	3'	4'	5'	6'	7'	8'	9'
12"	6.9	1.8	1.1	.13	–	–	–	–	–
18"	5.3	1.8	.9	.68	.13	–	–	–	–
24"	4.1	1.9	.75	.62	.43	.13	–	–	–

Light Bulb Conversion: 18.5W, 3155K Light Bulb, FCx.66



15336 BKT

15336 TZT



15323 AZT

15323 BE

15323 BKT

15323 TZT



15423 AZT

15423 BE

15423 BKT

15423 TZT

LARGE ECLIPSE

A larger version of our popular Eclipse design to cast a wider light spread on a wide path or patio.

Housing Aluminum with clear glass

Finish Textured Black or Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 35" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	8.7	3.3	1.1	.4	.1	—	—	—	—

ECLIPSE

A smaller scale, contemporary design with a dome cap that creates a soft, warm circular glow of light.

Housing Aluminum

Finish Textured Architectural Bronze, Textured Black, Textured Tannery Bronze® or Beach

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 37" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	14.7	4.8	1.8	1	—	—	—	—	—

SIDE MOUNT ECLIPSE

Popular dome cap design in a side-mounted fixture for more directional lighting.

Housing Aluminum

Finish Textured Architectural Bronze, Beach, Textured Black or Textured Tannery Bronze®

Light Source 12V Incandescent S-8 wedge base socket

Power Usage at 12V AC Input

VA MAX: 24.4-W(VA)

Supplied: 24.4-W(VA) 3156K (15598 CLR)

Optional: 18.5-W(VA) 3155K (15599 CLR)

Wiring 34" of usable #18-2, SPT-1-W leads. Cable connector supplied.

 
Mounting Accessories Included

8" In-ground stake

Optional Mounting Accessories

15601 – Surface Mounting Flange

15607 – Tree/Surface Mounting Bracket



Photometric with Lamp Supplied (fc)

Distance from Light	1'	2'	3'	4'	5'	6'	7'	8'	9'
Footcandles	44.3	18.6	5.7	1.8	.3	.2	—	—	—