


FL-600P Floor Box

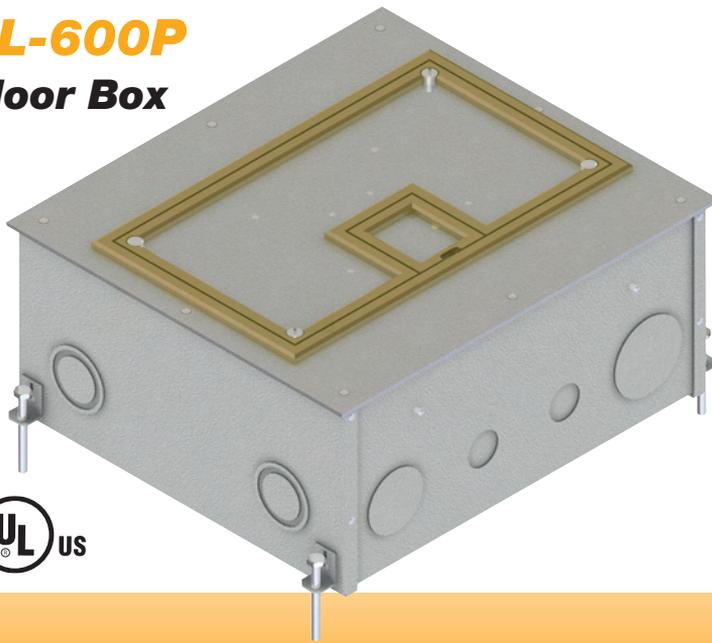

FSR

Metal Products Group

FL-600P Floor Box

- 11-gauge steel temporary construction cover included
- 11-gauge finished steel cover with choice of carpet edging
- Mitered brass or aluminum carpet edging .25" high, or flat and solid covers available
- Stainless steel compression latches on models with carpet flanges, and solid covers
- Lift-off full access door • Leveling feet

Scrub water approved for carpet, tile, and wood floors!

DESCRIPTION

Our FL-600P Floor Boxes combine rugged construction and an elegant design for use in carpet, tile or wood covered floors over poured concrete applications. This makes it the perfect floor box for ballrooms, convention spaces and high traffic areas. There is ample compartment room to accommodate power, audio, video, telecommunications and data in one elegant and practical box.

There are a variety of covers to choose from. Options include integrated carpet edging, flat covers for non-carpeted, bare floor applications and different finishes. The lift-off section of the cover allows full access to internal connector plates and stored cables. The hinged cable exit door flips back to allow the cover to remain in place after connections are made and cables are routed through it. The 0.25" raised edge style covers are UL scrub water approved.

The innovation continues to the "transformable" back box. The FL-600P's internal brackets can be arranged to provide numerous options for both high and low voltage standard gang openings making it the most flexible and easiest to install floor box available. Removable center dividers make passing cables through the various compartments a snap. Integral "Easy Pour" leveling feet are standard on all of the back boxes. Several box depths are available. The 3", 4", 6", 8" and 10" deep boxes are UL listed.

The unit includes all the necessary internal plates and brackets to make "pre" and "post" pour compartment changes quick and easy. Using this system, both high and low voltage gang configurations along with compartment isolation can be implemented "on the fly". This makes just about any cabling/connector scenario possible.

SPECIFICATIONS


Size: Box: 13.5" x 12" x depth
Cover: 14" x 12.5" x .125"

FL-600P KNOCKOUT SPECIFICATIONS

3" Box	
KO trade size	Qty/Box
3/4"	4
3/4" / 1.00"	10
1.00	4
1.00 / 1-1/4"	4
4" Box	
3/4"	4
3/4" / 1.00"	4
1.00" / 1-1/4"	4
1-1/2"	4
2.00"	4
6", 8" and 10" Box	
3/4"	4
3/4" / 1.00"	4
1.00" / 1-1/4" / 1-1/2"	4
1-1/2"	4
2.00"	4

BACK BOX DETAIL DRAWINGS


FL-600P-3

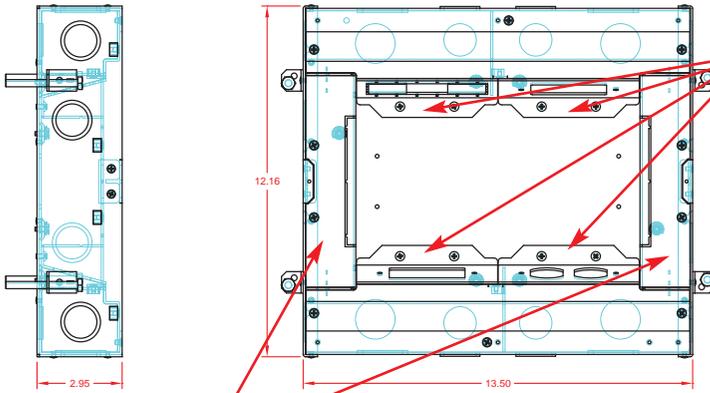


MAIN compartment areas include two duplex, two Decora and one 6-IPS brackets. Additional brackets are available as an option. (See ordering table)

"Pass-through" **END** compartment areas include brackets with integral blank plates. Additional brackets are available as an option. (See ordering table)


FL-600P-4

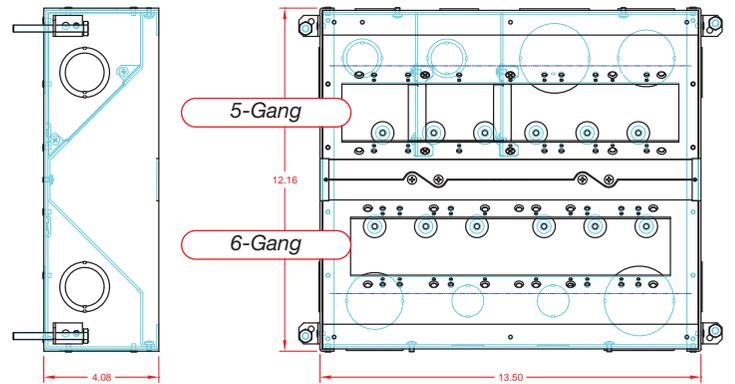

FL-600P-6

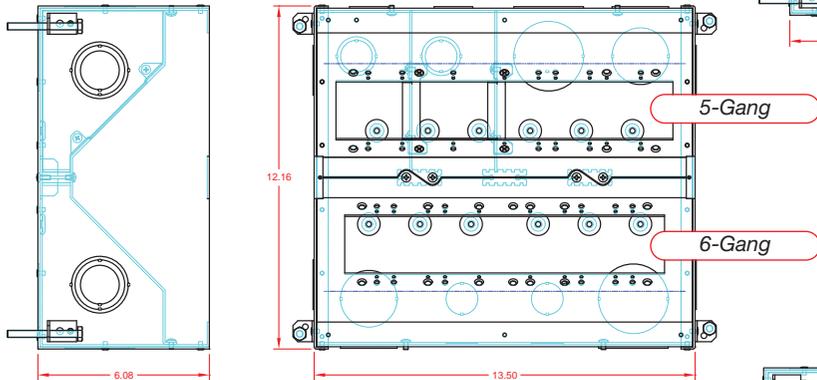

FL-600P-8

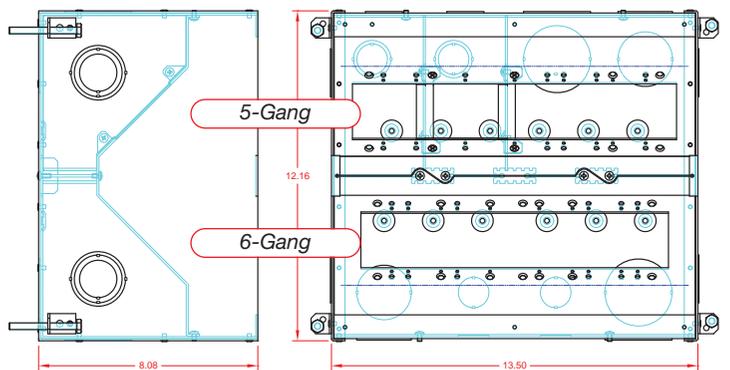

FL-600P-10

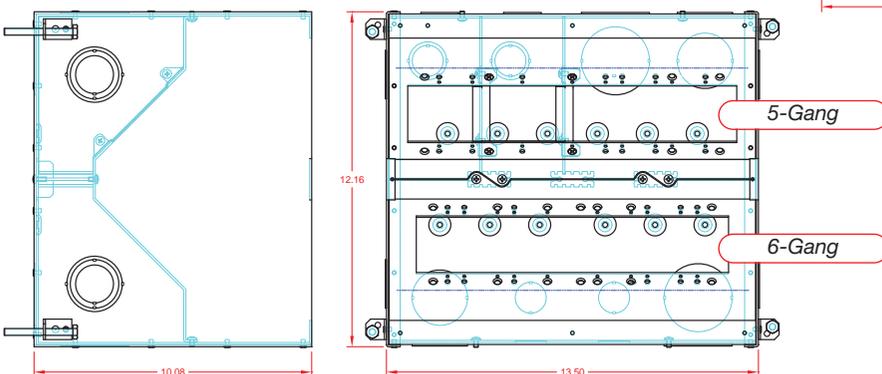


PLATE CONFIGURATIONS

5-gang side shown (4" through 10" boxes).

Plate Configuration 1-1-2

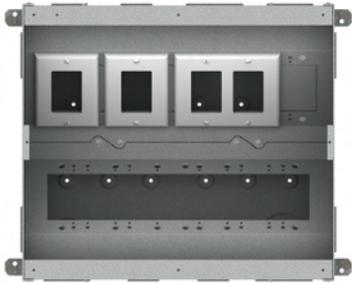


Plate Configuration 1-1-3

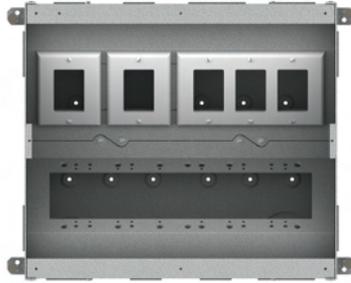


Plate Configuration 1-3-1

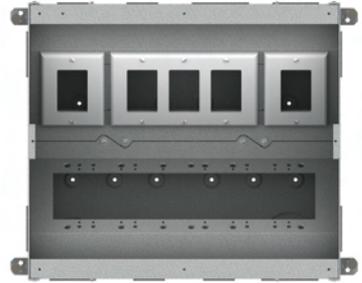


Plate Configuration 1-4

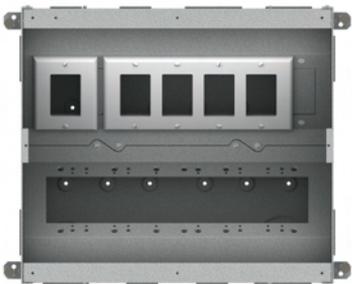


Plate Configuration 2-2

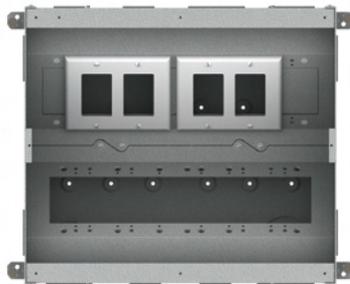


Plate Configuration 2-3

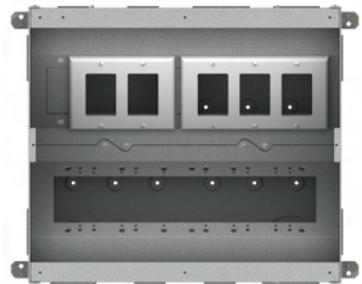


Plate Configuration 4-1

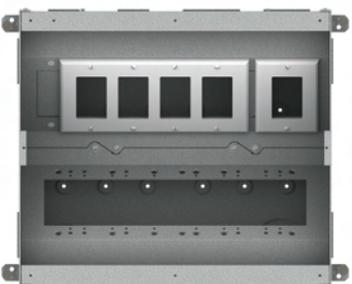


Plate Configuration 5-0

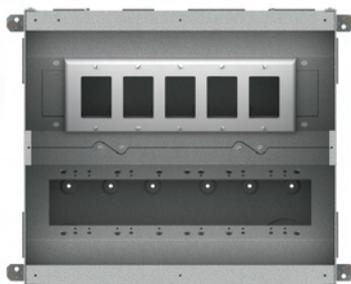


Plate Configuration 1-3 (a)

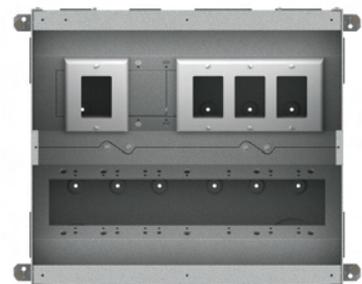


Plate Configuration 1-3 (b)

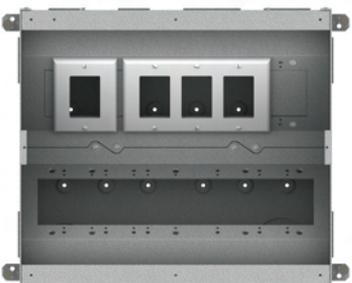


Plate Configuration 1-4

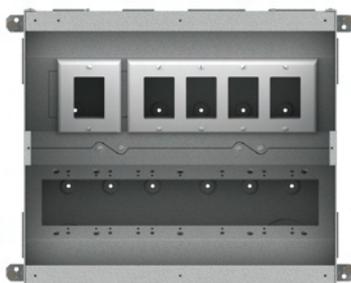


Plate Configuration 2-2 (a)

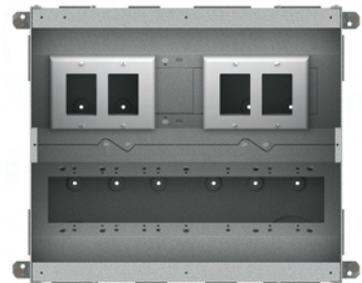


PLATE CONFIGURATIONS

6-gang side shown (4" through 10" boxes).

Plate Configuration 2-2 (b)

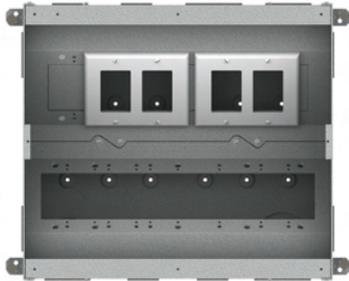


Plate Configuration 2-3

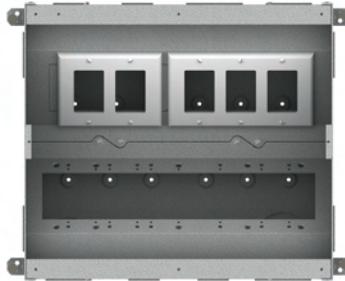


Plate Configuration 3-1

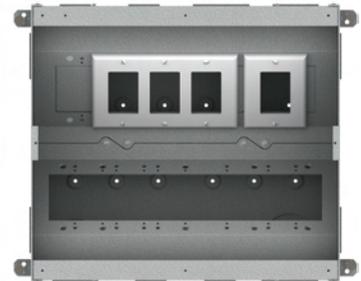


Plate Configuration 3-2

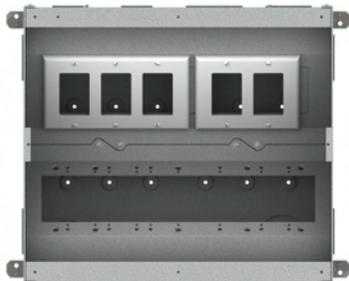


Plate Configuration 4-1



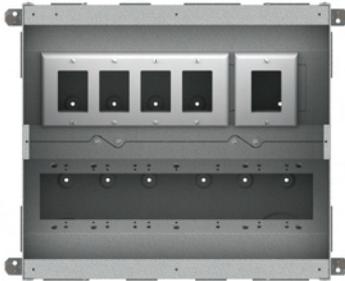


Plate Configuration 6-0





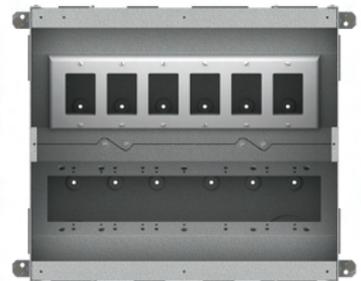


FL-600P "TRANSFORMABLE" BACK BOX

Available on 4" through 10" deep back boxes.

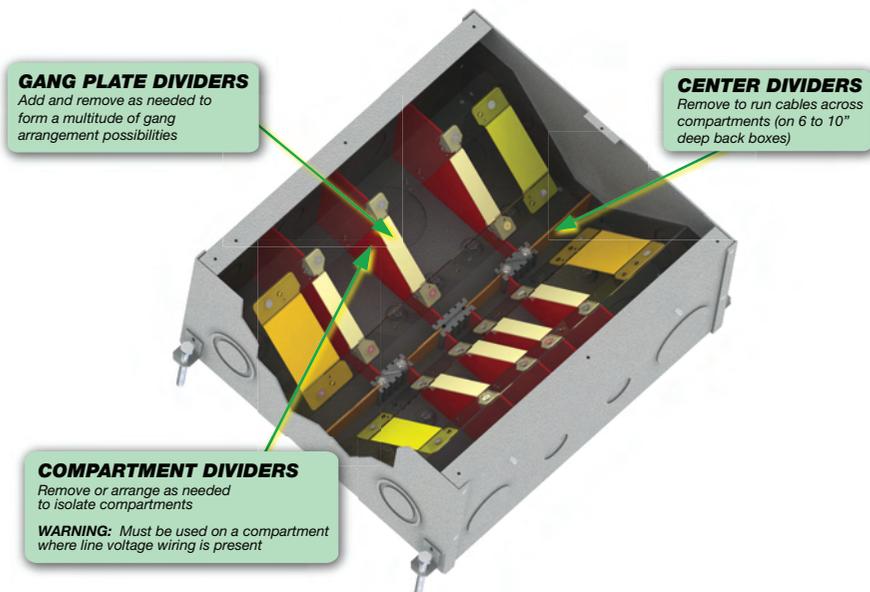

COVER DETAIL DRAWINGS

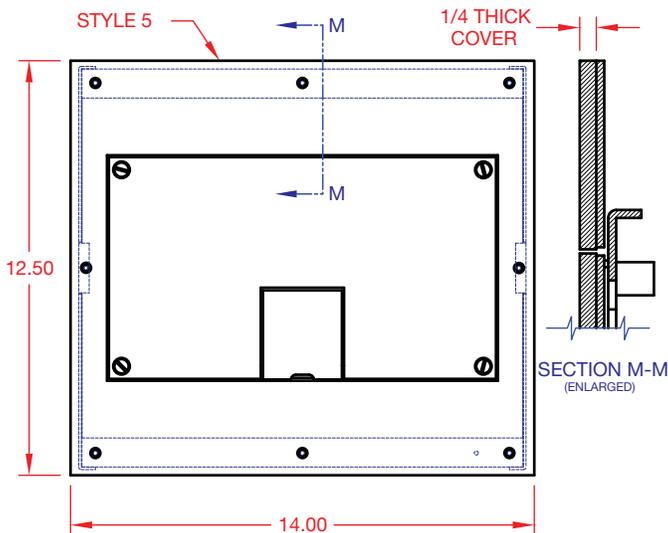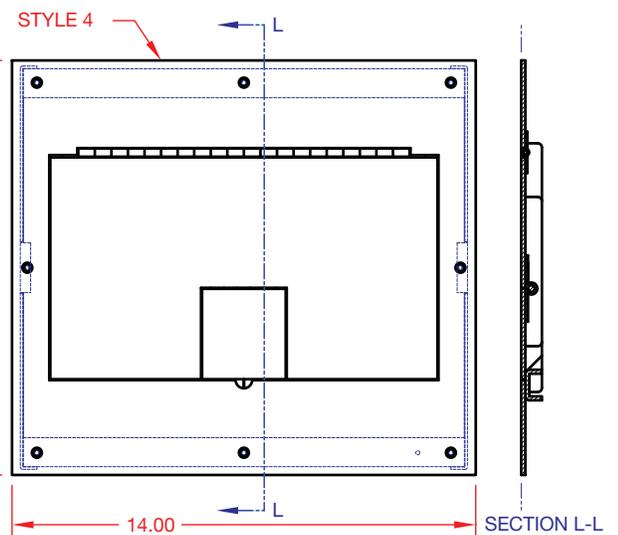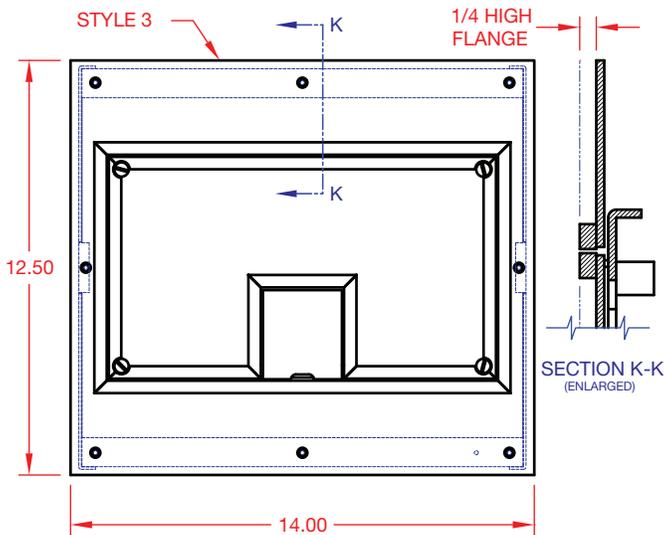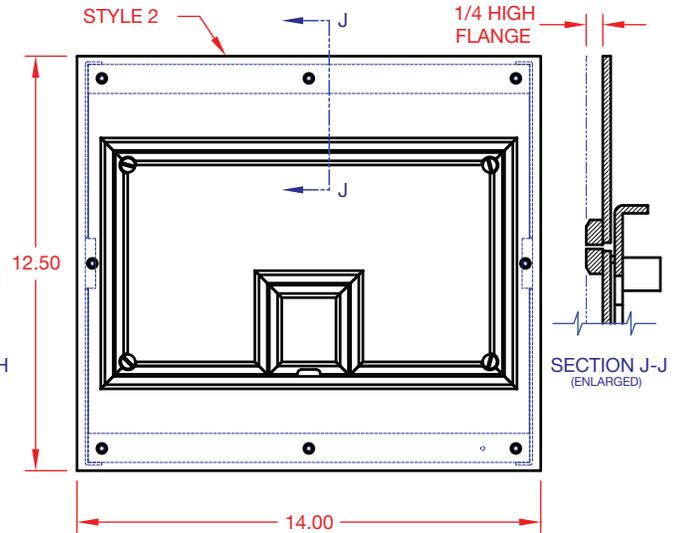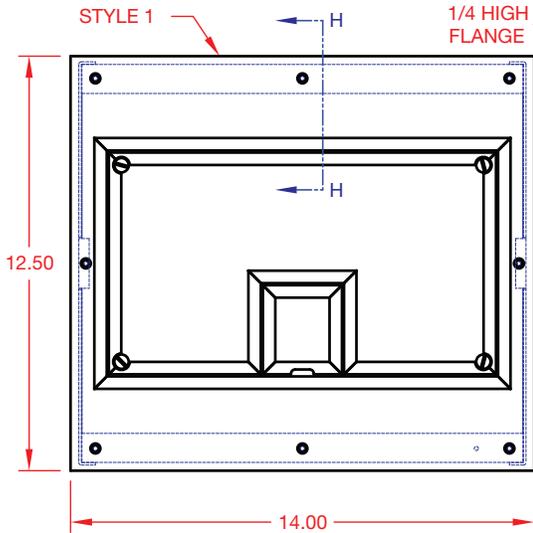


STYLE	MODEL NUMBER	DESCRIPTION
1	FL-600P-BSQ-C	1/4" BRASS FLANGE
1	FL-600P-SSQ-C	1/4" ALUMINUM FLANGE
2	FL-600P-BLP-C	1/4" BRASS FLANGE
2	FL-600P-SLP-C	1/4" ALUMINUM FLANGE
3	FL-600P-PLP-GRY-C	1/4" ALUMINUM FLANGE PAINTED GRAY
3	FL-600P-PLP-CLY-C	1/4" ALUMINUM FLANGE PAINTED CLAY
4	FL-600P-BLK-C	NO FLANGE, BLACK SANDTEX
4	FL-600P-OAK-C	NO FLANGE, OAK SANDTEX
4	FL-600P-SS	NO FLANGE, STAINLESS STEEL
5	FL-600P-SLD-ALU-C	1/4" ALUMINUM SOLID COVER
5	FL-600P-SLD-BLK-C	1/4" ALUMINUM SOLID COVER PAINTED BLACK
5	FL-600P-SLD-CLY-C	1/4" ALUMINUM SOLID COVER PAINTED CLAY
5	FL-600P-SLD-GRY-C	1/4" ALUMINUM SOLID COVER PAINTED GRAY

COVER OPTIONS



 FL-600P-BLP




FL-600P-BSQ



FL-600P-SLP



 FL-600P-SSQ



FL-600P-PLP-GRY



FL-600P-PLP-CLY



FL-600P-OAK



FL-600P-SS



FL-600P-SLD

Floor Box Covers and Back Boxes ordering information


FL-600P – Requires ordering Cover and Back Box separately

Part #	Description
Covers - UL Scrub Water Rated for Tile and Carpet Installations	
FL-600P-BLP-C	Cover With 1/4" Brass Carpet Flange (Lift off door)
FL-600P-BSQ-C	Cover with 1/4" Square Brass Flange (Lift off door)
FL-600P-SLP-C	Cover With 1/4" Aluminum Carpet Flange (Lift off door)
FL-600P-SSQ-C	Cover With 1/4" Square Aluminum Flange (Lift off door)
FL-600P-PLP-GRY-C	Cover with 1/4" Painted Carpet Flange - Gray (Lift off door)
FL-600P-PLP-CLY-C	Cover with 1/4" Painted Carpet Flange - Clay (Lift off door)
FL-600P-PLP-BLK-C	Cover with 1/4" Painted Carpet Flange - Black (Lift off door)
Covers - UL Scrub Water Rated - No Carpet Trim	
FL-600P-SLD-BLK-C	Solid Cover w/ Cable Exit (No Trim) Black
FL-600P-SLD-GRY-C	Solid Cover w/ Cable Exit (No Trim) Gray
FL-600P-SLD-CLY-C	Solid Cover w/ Cable Exit (No Trim) Clay
FL-600P-SLD-ALU-C	Solid Cover w/ Cable Exit (No Trim) Aluminum
Covers	
FL-600P-BLK-C	Cover (No Flange) With Hinged Door in Black Sandtex
FL-600P-OAK-C	Cover (No Flange) With Hinged Door in Lt. Oak Sandtex
FL-600P-SS-C	Cover (No Flange) With Hinged Door in Stainless Steel
Back boxes - UL Listed - Includes Steel Construction Cover	
FL-600P-3-B	FL-600P Back Box - 3" Deep 6 x 1-Gang Areas
FL-600P-4-B	FL-600P Back Box - 4" Deep
FL-600P-6-B	FL-600P Back Box - 6" Deep
FL-600P-8-B	FL-600P Back Box - 8" Deep
FL-600P-10-B	FL-600P Back Box - 10" Deep
Optional Brackets for FL-600P-3-B Back Box (END compartment areas)	
FL-600P3"-EP-DEC	Decora Optional Bracket
FL-600P3"-EP-DUP	Duplex Optional Bracket
FL-600P3"-EP-4IPS	4-IPS Optional Bracket
Optional brackets for FL-600P-3-B Back Box (MAIN compartment areas)	
FL-P3"-Decora	Decora optional Bracket
FL-P3"-Duplex	Duplex optional Bracket
FL-P3"-6IPS	6-IPS optional Bracket
FL-P3"-Blank	Blank optional Bracket

* Black covers not pictured.

POUR PAN ACCESSORY

The FSR Pour Pan is the answer to floor box installations that are on grade. If your application is a poured concrete floor, but the box may rest on soil, rock, gravel, etc., you must first install the Pour Pan. The Pour Pan is set into the grade below the floor box and allows concrete to flow around and under the box to prevent the floor box from contacting the grade. The unit comes with extended length leveling feet, and the unique "pan wings" prevent the pan from shifting during the pour.

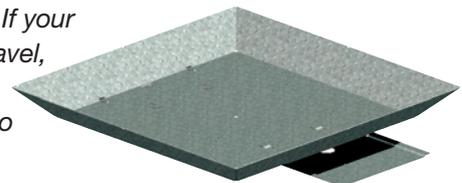

FSR

244 Bergen Boulevard, Woodland Park, NJ 07424

Phone: 973.785.4347 · Fax: 973.785.4207

Web: www.fsrinc.com · E-mail: sales@fsrinc.com LIT1058D



Specifications are subject to change without notice.