



20
13

A CONTINUED
COMMIT
MENT
TO
EXCELL
ENCE



Table of Contents

CEILING FANS	1-39
Pilot DC-155.....	1
Decca	2
Valore	3
Primera	4
Garvin	5
Xia	6
Linden	7
Brookport.....	8
Saturn-EX	9
Aracruz	10
Saturn.....	11
Skylark.....	12
Stargate	13
Fernleaf Breeze.....	14
Ponderosa.....	14
Nautika	15
Eurostar	16
Boardwalk	17
French Quarter	17
San Marcos	18
Rosemount.....	18
Richmond.....	19
Roosevelt.....	20-21
Madison.....	22-23
Madison Hugger.....	23
Capetown.....	24
Decorama	25
California Home	26-27
Home Air	28
Porch	29
Heritage Designer	30
Heritage Home	31
Heritage Square	32
Heritage Fusion.....	33
Heritage Square	34
Heritage Fusion.....	35
42" Heritage Square & Heritage Home	36
Montego Bay Deluxe.....	37
Hugger.....	38-39
 LIGHT KITS	 40-49
GLASS	50-51
Remote Controls	52-53
ACCESSORIES	54
Fan Blades	55
STANDARD FEATURES	56-58
INFORMATION	59
FAN SPECIFICATIONS	60-63
ABBREVIATIONS	64
INDEX	65-67



Learn more
on pg.58

Pilot DC - 155

CONCORD • PILOT DC-155



60PI3EST

Stainless Steel

PB-13460-NP (Natural Pine Blades Included)

G-3 Frosted Opal Glass

60" Pilot DC-155 Fan

- 3 Blade 60" Pilot DC155 Fan
- Motor Size: BLDC155
- Blade Pitch: 14°
- 6" Downrod Included
- Downlight - 1x100 E-11 Mini-can Halogen Included
- RM-DC-1 Six Speed Remote Control Included



Decca



Learn more
on pg.58



60DEC3EST

Stainless Steel
PB-13360-CH (Chrome Blades Included)
Shown with and without Light Kit
G-4 Frosted Opal Glass

60" Decca Fan

- 3 Blade 60" Decca Fan
- Motor Size: BLDC165 Brushless DC Motor
- Blade Pitch: 14°
- 6" Downrod Included
- Downlight: 1x100 E-11 Mini-can Base Bulb Included
- RM-DC-2 Six Speed Remote Control Included



Valore

Quick Connect



52VALQC5ESN

Satin Nickel
PB-2033-CH/RW
(Chrome/Rosewood Blades Included)
G-1214-WH Frosted White Glass



52VALQC5EWH

White
PB-2033-WH (White Blades Included)
G-1214-WH Frosted White Glass

- 3 Step Easy Installation



52" Valore Quick Connect Fan

- 5 Blade 52" Valore Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- Downlight: 3x60W E12 Base, Bulbs Included
- 3 Step Easy Installation



Primera



Learn more
on pg.58



52PR4MB

Matte Black

PB-4000-CHW/DW (Cherry Wood/ Dark Walnut Blades Included)

52" Primera Fan

- 2 or 4 Blade 52" Primera Fan
- Motor Size: BLDC 150 Brushless DC Motor
- Blade Pitch: 20°
- RM-DC-4 Three Speed Remote Control Included
- Mounts directly to ceiling joist

* 60" Model Available

+60PR2MB

(PB-4060-CHW/DW Blades Included)





52GA4EOBB

Oil Brushed Bronze
PB-2852-NC (Natural Cherry Blades Included)
G-7 Frosted Opal Glass

52" Garvin Fan

- 4 Blade 52" Garvin Fan
- Motor Size: 172mm X 20mm
- Blade Pitch: 20°
- 4-1/2" Downrod Included
- Downlight: 2 x 60W E-12 Base Bulbs Included
- RM-101-S Remote Control Included



Xia**52XI5EST**

Stainless Steel

PB-2652-CH/RW (Chrome/Rosewood Blades Included)

G-10 Satin Opal Glass

52" Xia Fan

- 5 Blade 52" Xia Fan
- Motor Size: 153mm x 18mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- Downlight: 1x100W E-11 Mini-can Base Bulb Included
- RM-101-S Remote Control Included



Linden



52LIN5EORB

Oil Rubbed Bronze
PB-1054A-WB (ABS Weathered Bronze Blades Included)
G7706 Satin Opal Glass

52" Linden Fan

- 5 Blade 52" Linden Fan
- Motor Size: 153mm X 16mm
- Blade Pitch: 12°
- 4-1/2" Downrod Included
- Downlight: 2x13W Medium Base CFL Bulbs Included
- Damp Location Rated



Brookport



52BR5EORB

Oil Rubbed Bronze

PB-2752-ORB/NC (Oil Rubbed Bronze/Natural Cherry Blades Included)

G-11 White Frosted Glass

52" Brookport Fan

- 5 Blade 52" Brookport Fan
- Motor Size: 172mm x 14mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Downlight: 3 x 60W E-12 Base Bulbs Included



Saturn-Ex

CONCORD • SATURN-EX



52SAX5EST

Stainless Steel
PB-2300-BG (Black Gloss Blades Included)
G52376 Frosted Opal Glass

52" Saturn-Ex Fan

- 5 Blade 52" Saturn-Ex Fan
- Motor Size: 172mm X 17mm
- Blade Pitch: 13°
- 6" Downrod Included
- Downlight 1x100W J-Type T3 Halogen Bulb Included



Aracruz



52AC5ORB

Oil Rubbed Bronze
PB-1032-ORB (Oil Rubbed Bronze Blades Included)
Shown with optional Light Kit: Y-281A-S-ORB



60AC5ORB

Oil Rubbed Bronze
PB-2560-ORB (Oil Rubbed Bronze Blades Included)

52" Aracruz Fan

- 5 Blade 52" Aracruz Fan
- Motor Size: 188mm X 15mm
- Blade Pitch: 14°
- 6" Downrod Included
- Uplight: 4x40W E-12 Bulbs Included
- Uplight on 4-Way Switch
HI-MED-LOW-OFF



60" Aracruz Fan

- 5 Blade 60" Aracruz Fan
- Motor Size: 212mm X 25mm
- Blade Pitch: 14°
- 6" Downrod Included
- Uplight: 4x40W E-12 Bulbs Included
- Uplights on 4-Way Switch
HI-MED-LOW-OFF





52SAT5ESN

Satin Nickel

PB-2300-RWG/DWG

(Rosewood Gloss/Dark Walnut Gloss Blades Included)

G52376 Frosted Opal Glass



52SAT5EWH

White

PB-2300-WH (White Blades Included)

G52376 Frosted Opal Glass

52" Saturn Fan

- 5 Blade 52" Saturn Fan
- Motor Size: 172mm x 17mm
- Blade Pitch: 13°
- 6" Downrod Included
- Downlight: 2x13W GU24 CFL Lamps Included
- RM-103-S Non-Dimming Remote Included



Skylark



52SKY3ESN

Satin Nickel
PB-1030-RW/DW
(Rosewood/Dark Walnut Blades Included)
G52837 Frosted Opal Glass



52SKY3EWH

White
PB-1030-WH (White Blades Included)
G52837 Frosted Opal Glass

52" Skylark Fan

- 3 Blade 52" Skylark Fan
- Motor Size: 153mm x 18mm
- Blade Pitch: 13°
- 6" Downrod Included
- Downlight: 2x60W E12, Base Bulbs Included
- Dual Mount Hanging Kit Included
- RM-101-S Remote Included



Stargate

CONCORD • STARGATE



52STG5EST

Stainless Steel
PB-2305-BK (Black Blades Included)
G52378 Frosted Opal Glass

52" Stargate Fan

- 5 Blade 52" Stargate Fan
- Motor Size: 188mm x 15mm
- Blade Pitch: 13°
- 4 1/2" Downrod Included
- RM-101-S Remote Control Included
- Downlight: 1x100W Halogen Mini-Can E-11 Lamp Included



Fernleaf Breeze



52FEB5RI

Rustic Iron
PB-5102A-DK (ABS Dark Fernleaf Blades Included)

Optional Light Kit PA-017-S-RI



Ponderosa



52PD5OWL

Old World Leather
PB-2022A-KP (ABS Knotty Pine Blades Included)
Shown w/ Optional Light Kit: PA-250A-S-OWL

52" Fernleaf Breeze Fan

- 5 Blade 52" Fernleaf Breeze Fan
- Motor Size: 172mm X 17mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Remote Control Adaptable When Used Indoors
- Optional Light Kit PA-017-S-RI
- Stainless Steel Screws



52" Ponderosa Fan

- 5 Blade 52" Ponderosa Fan
- Motor Size: 188mm x 15mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Remote Control Adaptable When Used Indoors
- Optional Light Kit PA-250A-S-OWL



**52NA5GH**

Graphite

PB-1052A-GH (ABS Wood Grain Blades Included)

**52NA5ORB**

Oil Rubbed Bronze

PB-1052A-WB (ABS Weathered Bronze Blades Included)

**52NA5WH**

White

PB-1052A-WH (ABS White Blades Included)

52" & 44" Nautika Fan

- 5 Blade 52" & 44" Nautika Fan
- Motor Size: 172mm x 17mm
- Blade Pitch: 14° • 4 1/2" Downrod Included
- ABS Wood Grain Blades
- Remote Control Adaptable When Used Indoors
- Stainless Steel Screws

* 44" Models Available

+44NA5ORB

(PB-1044A-WB Blades Included)

+44NA5GH

(PB-1044A-GH Blades Included)

+44NA5WH

(PB-1044A-WH Blades Included)



Eurostar



52EU5EOBB

Oil Brushed Bronze
PB-2452-ELM (Elm Blades Included)
EU-1060-OP Satin Opal Glass



52EU5EST

Stainless Steel
PB-2452-NP (Natural Pine Blades Included)
EU-1060-OP Satin Opal Glass

52" Eurostar Fan

- 5 Blade 52" Eurostar Fan
- Motor Size: 188mm x 15mm
- Blade Pitch: 13°
- 6" Downrod Included
- RM-08-W Wall Control Included
- Uplight: 4x40W E12 Base Bulbs Included
- Downlight: 3x60W E12 Base Bulbs Included



Boardwalk



52BW5AP

Aged Pecan
PB-1053A-WB
(ABS Weathered Bronze Blades Included)
BW-1060-AAS Antique Amber Scavo Glass

French Quarter



52FQ5ORB

Oil Rubbed Bronze
PB-1133-ORB (Oil Rubbed Bronze Blades Included)

52" Boardwalk Fan

- 5 Blade 52" Boardwalk Fan
- Motor Size: 172mm x 17mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Downlight: 2x18W Medium Base CFL Lamps Included



52" French Quarter Fan

- 5 Blade 52" French Quarter Fan
- Motor Size: 153mm x 20mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Quadruple Locking Mounting System Included



San Marcos



52SM5EST

Stainless Steel

PB-2025-MH (Mahogany Blades Included)

G-024 Clear Prism Glass

Rosemount



52RO5SN

Satin Nickel

PB-2023-RW/NM

(Rosewood/Nude Maple Blades Included)

G7772 White Alabaster Glass

*42" Model Available

42RO5SN

PB-2042-RW/NM

(Rosewood/Nude Maple Blades Included)

52" San Marcos Fan

- 5 Blade 52" San Marcos Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- RM-101-S Universal Remote Adaptable
- Dual Mount Hanging Kit Included
- Downlight: 3x60W E12 Base, Bulbs Included



42" & 52" Rosemount Fan

- 5 Blade 42" & 52" Rosemount Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- Downlight: 3x60W E12 Base, Bulbs Not Included





Learn more
on pg.58

Richmond

CONCORD • RICHMOND



52RIC5EST

PB-2025-BK/RW (Black/Rosewood Blades Included)
G52889 - Clear Chisel Glass



42RIC5EST

PB-2034-BK/RW (Black/Rosewood Blades Included)
G52889 - Clear Chisel Glass

52" Richmond Fan

- 5 Blade 52" Richmond Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4-1/2" Downrod Included
- Downlight: 3 x 60W E-12 Bulbs Included
- Dual Mount Hanging Kit Included

42" Richmond Fan

- 5 Blade 42" Richmond Fan
- Motor Size: 153mm x 10mm
- Blade Pitch: 12°
- 4-1/2" Downrod Included
- Downlight: 3 x 60W E-12 Bulbs Included
- Dual Mount Hanging Kit Included



Roosevelt



60RS5ST

Stainless Steel
PB-2160-CH/RW (Chrome/Rosewood
Blades Included)



60RS5ORB

Oil Rubbed Bronze
PB-2160-ORB
(Oil Rubbed Bronze Blades Included)



60RS5OBB

Oil Brushed Bronze
PB-2160-EMN (Elm/Natural Cherry
Blades Included)



60RS5SN

Satin Nickel
PB-2160-RW (Rosewood Blades Included)

60" & 70" Roosevelt Fan

- 5 Blade 60" & 70" Roosevelt Fans
- Motor Size: 212mm X 28mm
- Blade Pitch: 15°
- 4 1/2" Downrod Included
- Quadruple Locking Mounting System Included



* 70" Models Available

+70RS5ST

(PB-2170-CH/RW Blades Included)

+70RS5SN

(PB-2170-RW Blades Included)

+70RS5ORB

(PB-2170-ORB Blades Included)

+70RS5OBB

(PB-2170-EMN Blades Included)

**52RS5ST**

Stainless Steel
PB-2152-CH/RW
(Chrome/Rosewood Blades Included)

**52RS5SN**

Satin Nickel
PB-2152-SR (Silver Oak/Rosewood Blades Included)

**52RS5ORB**

Oil Rubbed Bronze
PB-2152-ORB
(Oil Rubbed Bronze Blades Included)

**52RS5OBB**

Oil Brushed Bronze
PB-2152-EMN (Elm/Natural Cherry Blades Included)

52" Roosevelt Fan

- 5 Blade 52" Roosevelt Fan
- Motor Size: 153mm X 17mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Quadruple Locking Mounting System Included



Madison



52MA5ORB

Oil Rubbed Bronze

PB-1033-ORB (Oil Rubbed Bronze Blades Included)



52MA5AB

Antique Brass

PB-1033-LD (Light & Dark Oak Blades Included)



52MA5WH

White

PB-1033-WH (White Blades Included)

52" Madison Fan

- 5 Blade 52" Madison Fan
- Motor Size: 188mm X 22mm
- Blade Pitch: 15° • 4 1/2" Downrod Included
- Optional PB-1033ABS Blades Available
- Quadruple Locking Mounting System Included





+60MA5AB

Antique Brass
PB-10336-LD (Light & Dark Oak Blades Included)



+60MA5ORB

Oil Rubbed Bronze
PB-10336-ORB
(Oil Rubbed Bronze Blades Included)



+60MA5WH

White
PB-10336-WH (White Blades Included)

Madison Hugger

52MAH5ORB

Oil Rubbed Bronze
PB-1033-ORB
(Oil Rubbed Bronze Blades Included)

* 60" Model Available

+60MAH5ORB

PB-10336-ORB (Oil Rubbed Bronze
Blades Included)



60" Madison Fan

- 5 Blade 60" Madison Fan
- Motor Size: 188mm X 22mm
- Blade Pitch: 16°
- 4 1/2" Downrod Included
- Quadruple Locking Mounting System Included

52" Madison Hugger Fan

- 5 Blade 52" Madison Hugger Fan
- Motor Size: 188mm X 25mm
- Blade Pitch: 16°



Capetown



52CP6ORB

Oil Rubbed Bronze

PB-2010-ORB (Oil Rubbed Bronze Blades Included)

52" Capetown Fan

- 6 Blade 52" Capetown Fan
- Motor Size: 188mm X 25mm
- Blade Pitch: 16°
- 4 1/2" Downrod Included
- Uplight: 4x40W E12 Bulbs Included
- Uplight On 4-Way Switch HI-MED-LOW-OFF
- Quadruple Locking Mounting System Included





Decorama

52DCO5WORB

Oil Rubbed Bronze
PB-2012-ORB
(Oil Rubbed Bronze Blades Included)



52DCO5WWH

White
PB-2012-WH (White Blades Included)



52DCO5WOBB

Oil Brushed Bronze
PB-2012-EMN
(Elm/Natural Cherry Blades Included)



52DCO5WST

Stainless Steel
PB-2012-NP (Natural Pine Blades Included)

52" Decorama Fan

- 5 Blade 52" Decorama Fan
- Motor Size: 188mm X 12mm
- Blade Pitch: 14°
- 4 1/2" Downrod Included
- Quadruple Locking Mounting System Included



* 42" Models Available

+42DCO5WORB

(PB-2042-ORB Tip Blades Included)

+42DCO5WWH

(PB-2042-WH Tip Blades Included)

+42DCO5WOBB

(PB-2042-EMN Tip Blades Included)

+42DCO5WST

(PB-2042-NP Tip Blades Included)

California Home



52CH5SN

Satin Nickel
PB-2222-SR
(Silver Oak/Rosewood Blades Included)



52CH5OBB

Oil Brushed Bronze
PB-2222-EMN
(Elm/Natural Cherry Blades Included)



52CH5ORB

Oil Rubbed Bronze
PB-2222-ORB (Oil Rubbed Bronze Blades Included)



52CH5BB

Polished Brass
PB-2222-LD (Light/Dark Oak Blades Included)

52" California Home Fan

- 5 Blade 52" California Home Fan
- Motor Size: 172mm X 14mm
- Blade Pitch: 13° • 4 1/2" Downrod Included
- 4 or 5 Blades Interchangeable
- Coupling Cover Included
- PB-2222 Soft Square Blades Included



* 42" Models Available

+42CH5SN

(PB-2042-SR Blades Included)

+42CH5OBB

(PB-2042-EMN Blades Included)

+42CH5ORB

(PB-2042-ORB Blades Included)

+42CH5BB

(PB-2042-LD Blades Included)

California Home



52CH5AB

Antique Brass
PB-2222-LD (Light/Dark Oak Blades Included)



52CH5RB

Rubbed Bronze
PB-2222-DW/WP
(Dark Walnut/Weathered Pine Blades Included)



52CH5ST

Stainless Steel
PB-2222-NP (Natural Pine Blades Included)



52CH5WH

White
PB-2222-WH (White Blades Included)

52" California Home Fan

- 5 Blade 52" California Home Fan
- Motor Size: 172mm X 14mm
- Blade Pitch: 13° • 4 1/2" Downrod Included
- 4 or 5 Blades Interchangeable
- Coupling Cover Included
- PB-2222 Soft Square Blades Included



* 42" Models Available

+42CH5AB

(PB-2042-LD Blades Included)

+42CH5RB

(PB-2042-DW/WP Blades Included)

+42CH5ST

(PB-2042-NP Blades Included)

+42CH5WH

(PB-2042-WH Blades Included)

Home Air



52HA5EWH

White
PB-2222-WH (White Blades Included)
G-005 Frosted Ribbed Glass



52HA5ESN

Satin Nickel
PB-2222-SO/RW (Silver Oak/
Rosewood Blades Included)
G7747 Frosted Scalloped Glass

52" Home Air Fan

- 5 Blade 52" Home Air Fan
- Motor Size: 153mm X 16mm
- Blade Pitch: 13° • 4 1/2" Downrod Included • Coupling Cover Included
- Downlight: 3x60W E12 Base Bulbs Included



Porch



52POR5WH

White

PB-1052A-WH (ABS Wood Grain Blades Included)



52POR5ORB

Oil Rubbed Bronze

PB-1052A-WB (ABS Weathered Bronze Blades Included)

52" Porch Fan

- 5 Blade 52" Porch Fan
- Motor Size: 153mm x 12mm
- Blade Pitch: 11°
- 4 1/2" Downrod Included
- Remote Control Adaptable When Used Indoors
- ABS Wood Grain Blades
- Stainless Steel Screws
- Dual Mount Hanging Kit Included



* 44" Models Available

+44POR5ORB

(PB-1044A-WB Blades Included)

+44POR5WH

(PB-1044A-WH Blades Included)

Heritage Designer



52HED5EORB

Oil Rubbed Bronze

PB-2023-ORB (Oil Rubbed Bronze Blades Included)

G-1201-AAS (Antique Amber Scavo Glass)

52" Heritage Designer Fan

- 5 Blade 52" Designer Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- Downlights: 3x60W E12 Base Bulbs Included





52HEH5ESN

Satin Nickel
PB-2023-SR
(Rosewood/Silver Oak
Blades Included)
G7772 White Alabaster Glass



52HEH5EBB

Polished Brass
PB-2023-LD
(Light/Dark Oak Blades Included)
G7772 White Alabaster Glass



52HEH5EWH

White
PB-2023-WH (White Blades Included)
G7772 White Alabaster Glass



52HEH5ERB

Rubbed Bronze
PB-2023-DW/WP (Dark Walnut/
Weathered Pine Blades Included)
G-088T Tea Stained Glass



52HEH5EORB

Oil Rubbed Bronze
PB-2023-ORB (Oil Rubbed Bronze
Blades Included)
G-088AAS Antique Amber Scavo Glass

52" Heritage Home Fan

- 5 Blade 52" Heritage Home Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12° • 4 1/2" Downrod Included
- RM-101 Universal Remote Adaptable
- Dual Mount Hanging Kit Included
- Downlight: 3x60W E12 Base Bulbs Included



Heritage Square



52HES5EORB

Oil Rubbed Bronze
PB-2023-ORB (Oil Rubbed Bronze Blades Included)
Y-202S-AAS Antique Amber Scavo Glass



52HES5ESN

Satin Nickel
PB-2023-SR (Rosewood/Silver Oak Blades Included)
Y-202S-WH Alabaster Glass



52HES5EST

Steel
PB-2023-CH/RW (Chrome/Rosewood
Blades Included)
Y-202S-WH Alabaster Glass

*Also Available in White

52HES5EWH

PB-2023-WH (White Blades Included)

52" Heritage Square Fan

- 5 Blade 52" Heritage Square Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- Dual Mount Hanging Kit Included
- Downlight: 3x60W E12 Base Bulbs Included



Heritage Fusion



52HEF5SN

Satin Nickel
PB-2023-BF/RW (Rosewood & Black Forest
Blades Included)
G7753 Twist-on Faux Alabaster Glass



52HEF5WH

White
PB-2023-WH (White Blades Included)
G7753 Twist-on Faux Alabaster Glass

52" Heritage Fusion Fan

- 5 Blade 52" Heritage Fusion Fan
- Motor Size: 153mm x 13mm
- Blade Pitch: 12°
- 4 1/2" Downrod Included
- Downlight: 2x13W E-26 CFL Bulbs Included
- Dual Mount Hanging Kit Included



Heritage Square

Energy Saver



52HES5ESN-ES

Satin Nickel

PB-2023-SR (Silver Oak & Rosewood Blades Included)

Y-202S-WH Alabaster Glass



52HES5EORB-ES

Oil Rubbed Bronze

PB-2023-ORB (Oil Rubbed Bronze Blades Included)

Y-202S-AAS Antique Amber Scavo Glass



52HES5EWH-ES

White

PB-2023-WH (White Blades Included)

Y-202S-WH Alabaster Glass

52" Heritage Square Energy Saver Fan

- 5 Blade 52" Heritage Square Energy Saver
- Motor Size: 153mm x 16mm
- Blade Pitch: 13°
- 4 1/2" Downrod Included
- Downlight: 2x13W GU24 CFL Bulbs Included
- Compatible with RM-103-S Remote
- Dual Mount Hanging Kit Included



Heritage Fusion

Energy Saver



52HEF5ESN-ES

Satin Nickel
PB-2023-BF/RW (Rosewood & Black
Forest Blades Included)
G7754 Twist-on
Satin Opal Glass



52HEF5ERB-ES

Rubbed Bronze
PB-2023-DW/BF (Dark Walnut & Black
Forest Blades Included)
G7754 Twist-on Satin Opal Glass



52HEF5EORB-ES

Oil Rubbed Bronze
PB-2023-ORB (Oil Rubbed
Bronze Blades Included)
G7754 Twist-on
Satin Opal Glass



52HEF5EWH-ES

White
PB-2023-WH (White Blades Included)
G7754 Twist-on Satin Opal Glass

52" Heritage Fusion - Energy Star Fan

- 5 Blade 52" Heritage Fusion - Energy Saver Fan
- Motor Size: 153mm x 16mm
- Blade Pitch: 13° • 4 1/2" Downrod Included
- Downlight: 2x13W GU24 CFL Bulbs Included
- Compatible with RM-103-S Remote
- Dual Mount Hanging Kit Included



42" Heritage Square & Heritage Home



42HES4ESN

Satin Nickel

PB-2223-SR (Silver Oak/Rosewood Blades Included)

G42877 White Alabaster Bowl Glass



42HES4EWH

White

PB-2223-WH (White Blades Included)

G42877 White Aladaster Bowl Glass



42HEH5ESN

Satin Nickel

PB-2223-SR (Silver Oak/Rosewood Blades Included)

G7747 Frosted Scalloped Glass



42HEH5EORB

Oil Rubbed Bronze

PB-2223-ORB (Oil Rubbed Bronze Blades Included)

G7774 Antique Amber Scavo Glass



42HEH5EWH

White

PB-2223-WH (White Blades Included)

G7745 Frosted Ribbed Glass

42" Heritage Square Fan

- 4 Blade 42" Heritage Square Fan
- Motor Size: 153mm X 10mm
- Blade Pitch: 12°
- Downlight: 2x60W E12 Base Bulbs Included
- PB-2223 Soft Square Blades Included
- Dual Mount Hanging Kit Included



42" Heritage Home Fan

- 5 Blade 42" Heritage Home Fan
- Motor Size: 153mm X 10mm
- Blade Pitch: 12°
- Downlight: 3x60W E12 Base Bulbs Included
- PB-2223 Soft Square Blades Included
- Dual Mount Hanging Kit Included



Montego Bay Deluxe



52MBD5BB

Polished Brass

PB-2023-LD (Light/Dark Oak Blades Included)

G7746 Clear Ribbed Glass



52MBD5WH

White

PB-2023-WH (White Blades Included)

G7749 Frosted Ribbed Glass

52" Montego Bay Deluxe Fan

- 5 Blade 52" Montego Bay Deluxe Fan
- Motor Size: 153mm X 13mm
- Blade Pitch: 11°
- Downlight: 4x40W E12 Base (Bulbs Excluded)



Hugger



52HUG5WH

White

PB-2023-WH (White Blades Included)



52HUG5BB

Polished Brass

PB-2023-LD (Light/Dark Oak Blades Included)

52" Hugger Fan

- 5 Blade 52" Hugger Fan
- Motor Size: 153mm X 15mm
- Blade Pitch: 12°
- Light Kit Adaptable





Hugger

Bullet Light Kit

42HUG4WH-Y408

White

PB-2223-WH (White Blades Included)



42HUG4BB-Y408

Polished Brass

PB-2223-LD (Light/Dark Oak Blades Included)



Hugger

Schoolhouse Light Kit

42HUG4WH-YG6

White

PB-2223-WH (White Blades Included)

G530 Schoolhouse Glass

*Also Available in Polished Brass

42HUG4BB-YG6

PB-2223-LD (Light/Dark Oak Blades Included)

52HUG5WH-YG8-GU

White

PB-2222-WH (White Blades Included)

G-8 Schoolhouse Glass

42" Hugger Fan - Bullet Light

- 4 Blade 42" Hugger Fan
- Bullet Light Kit
- Motor Size: 153mm X 10mm
- Blade Pitch: 12°
- Downlight: 4x40W E12 Base Bulbs Excluded



52" Hugger Fan - Schoolhouse

- 5 Blade 52" Hugger Fan - Schoolhouse
- Motor Size: 153mm X 13mm
- Blade Pitch: 12°
- Downlight 1x13 GU-24 Base CFL Bulb Included



42" Hugger Fan - Schoolhouse

- 4 Blade 42" Hugger Fan - Schoolhouse
- Motor Size: 153mm X 10mm
- Blade Pitch: 12°
- Downlight: 1x60W E12 Base Bulb Excluded



Light Kits

ANTIQUE BRASS (AB)



Y-401CG-S

4 Light • 40w Candelabra Base
B10 Torpedo Bulb (Included)
12" Diameter • 3-1/4" Height

ANTIQUE BRASS (AB)



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height

GRAPHITE (GH)



PA-210A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Only use on 52" Nautika Fans
UL Wet Location



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height

OLD WORLD LEATHER (OWL)



PA-250A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
13" Diameter • 7-3/8" Height
UL Wet Location

Light Kits

OIL RUBBED BRONZE (ORB)



PA-210A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Only use on 52" Nautika Fans
UL Wet Location



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height



Y-281A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11-3/4" Diameter • 6-1/4" Height



PA-211A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Satin Opal Glass
UL Wet Location w/Pull Chain



Y-262A-S

11" Diameter • 4-1/2" Height
2 Light • 13W Medium Base
CFL Spiral Bulb (Included)
Frosted Twist-on Glass



Y-301A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
12-1/2" Diameter • 4-3/4" Height



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height



Y-263A-ES

2 Light • 13w GU-24 Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height
Faux Alabaster Twist-on Glass



Y-309A-S

3 Light • 60w Candelabra
Base • B10 Torpedo Bulb
(Included)
13-5/8" Diameter • 5-3/4" Height
Iridescent Amber Glass

Light Kits

OIL RUBBED BRONZE (ORB)



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height



Y-401CG-S

4 Light • 40w Candelabra Base
B10 Torpedo Bulb (Included)
12" Diameter • 3-1/4" Height

POLISHED BRASS (BB)



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height



YG-10CG-S

1 Light • 13w Medium Base
CFL Spiral Bulb (Included)
8" Diameter • 8-1/2" Height
• 4" Fitter
Opal Glass



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height



YG-9CG-S

1 Light • 13w Medium Base
CFL Spiral Bulb (Included)
9" Diameter • 7" Height
• 4" Fitter



Y-401CG-S

4 Light • 40w Candelabra Base
B10 Torpedo Bulb (Included)
12" Diameter • 3-1/4" Height

Light Kits

OIL BRUSHED BRONZE (OBB)



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height
*Also Available in (OBB)



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height
*Also Available in (OBB)



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height
*Also Available in (OBB)

RUBBED BRONZE (RB)



Y-262A-S

11" Diameter • 4-1/2" Height
2 Light • 13W Medium Base
CFL Spiral Bulb (Included)
Frosted Twist-on Glass



Y-360A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
16" Diameter • 5-1/2" Height
Turismo Glass



Y-263A-ES

2 Light • 13w GU-24 Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height
Faux Alabaster Twist-on Glass



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6 1/2" Diameter • 3-1/4" Height

RUSTIC IRON (RI)



PA-017-S

ONLY use on 52" Fernleaf
Breeze Fan
1 Light • 23w Medium Base
CFL Spiral Bulb (Included)
8-1/4" Diameter • 8-1/4" Height
UL Damp Location

Light Kits

SATIN NICKEL (SN)



Y-262A-S

11" Diameter • 4-1/2" Height
2 Light • 13W Medium Base
CFL Spiral Bulb (Included)
Frosted Twist-on Glass



Y-360A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
16" Diameter • 5-1/2" Height
Linen Glass



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height



Y-263A

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height

Y-263A-ES

2 Light • 13w GU-24 Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height
Faux Alabaster Twist-on Glass



Light Kits

Stainless Steel (ST)



Y-220A-S

1 Light • 150w Halogen J-Type T-3
(Included)
12" Diameter • 4" Height



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height



Y-301A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
12-1/2" Diameter • 4-3/4" Height



Y-309A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
13-5/8" Diameter • 5-3/4" Height
Iridescent Amber Glass



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height



PA-211A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Satin Opal Glass
UL Wet Location w/Pull Chain

Light Kits

WHITE (WH)



PA-210A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Only use on 52" Nautika Fans
UL Wet Location



Y-220A-S

1 Light • 150w Halogen
J-Type T-3 (Included)
12" Diameter • 4" Height



PA-211A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
12" Diameter • 5-1/2" Height
Satin Opal Glass
UL Wet Location w/Pull Chain



Y-260A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height

Light Kits

WHITE (WH)



Y-263A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height

Y-263A-ES

2 Light • 13w GU-24 Base
CFL Spiral Bulb (Included)
11" Diameter • 4-1/2" Height
Faux Alabaster Twist-on Glass



Y-306CG-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
6-1/2" Diameter • 3-1/4" Height



Y-262A-S

2 Light • 13w Medium Base
CFL Spiral Bulb (Included)
11" Diameter • 3-1/2" Height



Y-401CG-S

4 Light • 40w Candelabra Base
B10 Torpedo Bulb (Included)
12" Diameter • 3-1/4" Height



Y-301A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
12-1/2" Diameter • 4-3/4" Height



Y-309A-S

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
13-5/8" Diameter • 5-3/4" Height
Faux Alabaster Glass

Light Kits

ADDITIONAL LIGHT KITS



YG-9CG-S

1 Light • 13w Medium Base
CFL Spiral Bulb (Included)
9" Diameter • 7" Height • 4" Fitter
Schoolhouse Glass



YG-10CG-S

1 Light • 13w Medium Base
CFL Spiral Bulb (Included)
8" Diameter • 8-1/2" Height • 4" Fitter
Opal Glass



Y-261A-S-03

2 Light • 13w Medium Base
CFL Spiral Bulbs (Included)
13" Diameter • 6 1/2" Height
G7756 Faux Alabaster Glass
PB, ORB, SN, WH Bottom Caps
& Finials Included

Y-261A-ES-S-03

2 Light • 13w GU-24 Base
CFL Spiral Bulbs (Included)
13" Diameter • 6 1/2" Height
G7756 Faux Alabaster Glass
PB, ORB, SN, WH Bottom
Caps & Finials Included



Y-261A-ES-S-04

2 Light • 13w GU-24 Base
CFL Spiral Bulbs (Included)
13" Diameter • 6 1/2" Height
G7756 Faux Alabaster Glass
SC, ST, ORB, OBB Bottom
Caps & Finials Included



Y-2001-S

- 3 • 60w Candelabra Base
B10 Bulb (Included)
- 3-1/2" Diameter
- 6-1/4" High
- Comes with Standard White
Finial & Cap (FC-1000-WH)
- Adjustable Height

Matching Finial & Cap
(FC-1000) are sold separately
Available in:
AB, BB, GH, OBB, ORB, RI

Extra Pull Chain (not shown)
in AB, BB, CH are included

Light Kits

ADDITIONAL LIGHT KITS



Y-396A-S-BB

Y-396A-S-WH

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
13" Diameter • 6-5/8" Height • 2-1/4" Fitters
G7746 Clear Prismatic Glass



Y-308A-S-WH

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
16" Diameter • 6" Height



Y-386A-S-RB

Y-386A-S-BB

Y-386A-S-SN

Y-386A-S-WH

3 Light • 60w Candelabra Base
B10 Torpedo Bulb (Included)
13" Diameter • 6-5/8" Height • 2-1/4" Fitters
G7772 Faux Alabaster Glass

Side Glass



G-004

Clear

Width 4 5/8" • Height 4 1/2"



G-005

Frosted

Width 4 7/8" • Height 4 1/4"



G-216

Clear

Width 4 1/8" • Height 4 7/8"



G-086ACS

Aged Cream Scavo

Width 5" • Height 4 7/8"



G-086

White Swirl

Width 5" • Height 4 7/8"



G-201

Frosted

Width 5 3/4" • Height 4 1/4"



G-216FR

Frosted

Width 4 1/8" • Height 4 7/8"

Glass

G-1201

12" Bowl Glass
Order ONLY with Y-2001-S Fitter



G-1201-CPS

Champagne Scavo
12" Bowl Glass



G-1201-AAS

Antique Amber Scavo
12" Bowl Glass



G-1201-EW

Etched White
12" Bowl Glass

Y-202S

Order ONLY with Y-2001-S Fitter



Y-202S-AAS

Antique Amber Scavo



Y-202S-WH

White

Remote Controls



Remote Transmitter

RM-08 Remote & Wall Control Combination

Also available in:

RM-08-R (Complete Remote Control Unit)

RM-08-W (Complete Wall Control Unit)

RM-09-R (Complete Remote Control Unit - Non-Dimming)

PD-011 (Wall Control Transmitter Only)

RM-08-A (Hand Held Remote Only)

Features:

- Requires no wiring
- Wall Control is battery operated (12 volt battery included)
- Controls multiple fans
- Packed with white & light almond face plate and wall plate
- 3 speed forward and reverse
- Full range dimming
- Uplights and Downlights controlled independently
- Includes Handheld Transmitter, Wall Control and 2 capacitors (only use 1 per chart)
- NOT compatible with any fans installed outdoors
- NOT compatible with fans equipped with fluorescent bulbs
- Compatible with Madison Hugger

Wall Control



Wall Control

Remote Controls

Universal Remote Controls

Features:

- 3 speed forward direction ONLY
- No reverse function
- Full range dimming
- Master On/Off
- Includes Transmitter and Receiver
- Does not need Receiver Shell
- NOT compatible with any fans installed outdoors
- NOT compatible with fans equipped with uplight feature
- Compatible with Madison Hugger



RM-100

Any Size Motor



RM-101-S

5+5UF Capacitor for Motor is smaller than 188mm X 15mm



RM-103-S

For use with non dimming fluorescent light kits

1). PD-001 (Clear Control Knob):

4 Speed Rotary Control includes De-Hummer Feature. Requires Standard 2 wire+ ground installation.

2). PD-002 (White)

3 Speed & 3 Level Light Slide Bar Control. Requires 3 wire+ ground installation

3). PD-003 (White)

3 Speed Slide Bar Control. Requires Standard 2 wire+ ground installation

4). PD-006 (White)

4 Speed Rotary Control. Designed for 3-way switching from 1 to 2 locations. Requires 3 wire+ ground installation.

5). PD-007 (White)

3 Speed Slide Bar Control. Designed for Multiple Fans (up to 2.5 amps total). Requires Standard 2 wire+ ground installation.

6). PD-007A (White): 3 Speed Slide Bar Control. Designed for Multiple Fans (up to 5.0 amps total). Requires Standard 2 wire+ ground installation



1



2



3



4



5 & 6

Accessories

Scrolls (Concord Exclusive)



AC-2030-12 (as shown)
(Pine Needle Scroll)
Use on minimum of 12" downrod

Optional Accessories



45AD series
(45 Degree Angle Adapter)
Includes Canopy,
Mounting Brackets,
Rubber Pads, and
Mounting Screws
Available in:
AB, AP, BB, GH, OBB, ORB,
OWL, RI, SN, ST, WH



PS-3022 series
(Flush Mount Kits)
Includes Canopy,
Mounting Brackets,
Rubber Pads, and
Mounting Screws
Fits most fans.
Available in:
AB, AP, BB, GH,
OBB, ORB, OWL, RI,
ST, WH



PSB-1001
(Beaded Chain) size #6
Available in: AB, BB, CH,
Length: AB, BB, CH are in
250 feet per roll;

SUPPORT RODS (1/2" ID)
12", 18", 24", 36", 48", 60", 72" lengths
Matching finishes to all ceiling fans
Threaded and drilled on both ends



DR-1000 series (Universal Coupler) • Available in: AB, BB, GH, ORB, OWL, ST, WH



Fan Blades

Accessory Blades



PB-5000A

(ABS Plastic Bamboo Blades)

Finishes (left to right):

Medium (MED); White (WH)

Use only on 52NA, 52DCO



PB-5002A

(ABS Plastic Fernleaf Blades)

Finishes: Dark (DK)

Use only on 52NA, 52DCO



PB-5003

(Carved Wooden Banana Blades)

Finish: Natural (NA)

Use only on Madison Series




PB-5004

(Carved Wooden Leaf Blades)

Finish: Natural (NA)

Use only on Madison Series

Standard Features

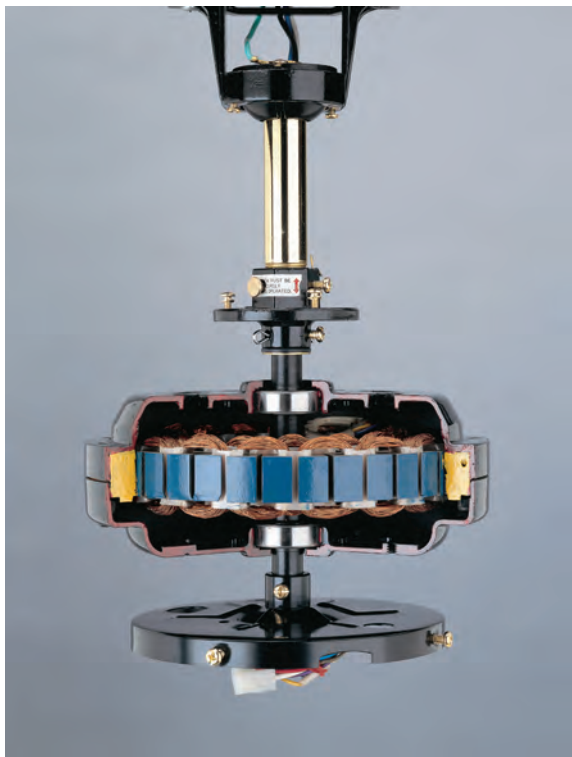

Concord Motor

The key to the life expectancy of a fan lies in its motor. Concord has spent years redesigning and refining our motors to produce the quietest, coolest running motors in the industry. Heat is the biggest enemy of a ceiling fan motor. Our motors are specially designed and sized to match the sweep and pitch of each fan, insuring a low heat operating environment within the unit. Highest quality components namely, H-60 grade silicon steel, heavy gauge copper wire and finest fiberglass insulation are a few of the other reasons a Concord motor is a "cool" motor. Pure aluminum die cast rotors are machined to tolerances thinner than a human hair. Two piece motor and rotor housings insure true Micro-Balanced operation. Constant magnetic flow is insured with vacuum dipped, lacquered stators. Factory lubricated and permanently sealed precision NTN ball bearings installed with bearing retainers provide years of silent, maintenance free use. Finally, our motor housings are stamped, lathed and instrument matched to insure a perfect fit between the various pieces and triple plated and double lacquered to provide for lasting beauty. And, Concord motors receive a 100% Quality Control inspection twice during production plus several more post-production Q.C. inspections.

MOTOR SHIPPING BLOCK

FACTORY INSTALLED MOTOR SHIPPING BLOCKS PROTECT MOTORS DURING TRANSIT.



TURBO 212 MOTOR

THE TURBO 212 IS OUR LARGEST MOTOR WITH A 212 MM OVERALL DIAMETER. POWERFUL, YET ENERGY EFFICIENT. HUGE, DOUBLE SEALED BEARINGS PROVIDE STABILITY AND BALANCE. 50CS1300 GRADE OF SILICON STEEL ON THE MOTOR STATOR INSURES THE HIGHEST PERFORMANCE.



80" LEAD WIRES (STANDARD ON ALL FANS)

OUR 80" LEAD WIRE IS DESIGNED WITH A SPECIAL OUTER INSULATION TO WITHSTAND CUTS AND NICKS PLUS TEMPERATURES UP TO 105° CELSIUS. THE EXTRA LENGTH ALLOWS FOR INSTALLATION OF CEILING FANS ON SUPPORT RODS OF UP TO 72" IN LENGTH WITHOUT WIRE SPLICING.



LIGHT FIXTURE GLASS HOLDER (GROMMETS)

THREADED GROMMETS IN EACH LIGHT FIXTURE GLASS HOLDER GUARANTEES A SECURE GRIP ON THE GLASS GLOBE. THESE GROMMETS WILL NOT STRIP OUT LIKE THE TYPE NORMALLY FOUND IN THE INDUSTRY.



BLDC - BRUSHLESS DC MOTOR

CONCORD OFFERS UNIQUE BRUSHLESS DC MOTORS. OUR NEW DC MOTOR USES COMPUTER TECHNOLOGY TO CREATE MULTIPLE SPEEDS, COOLER OPERATING TEMPERATURES, AND 65% ENERGY SAVINGS OVER TRADITIONAL FAN MOTORS.

Standard Features



QUADRUPLE LOCKING SYSTEM

DOUBLE THREADED DOWNROD, SAFETY CROSS SCREW, SET SCREW, SAFETY COTTER PIN.



MOONGLOW

USING 4 x 40 WATT BULBS, BUILT-IN UPLIGHTING CASTS A SOFT, INDIRECT GLOW FROM THE CEILING. E-12 TYPE CANDELABRA BULBS ARE INCLUDED. 4 WAY SWITCHING PROVIDES: HI - MED - LOW - OFF OPERATION.



4 WAY UPLIGHT SWITCH

PROVIDES: HI - MED - LOW - OFF OPERATION.



DETACHABLE SWITCH HOUSING

OUR SWITCH HOUSINGS ARE PRE-WIRED WITH MOLEX PLUG-IN CONNECTORS, PROVIDING EASE OF INSTALLATION AND SWIFT HANDLING OF POTENTIAL PROBLEM AREAS. IT ALSO ALLOWS FOR QUICK AND EASY ADDITION OF REMOTE AND/OR WALL CONTROL OPERATION SYSTEM.



GASKETS

EXCLUSIVE TO CONCORD IS A PRE-APPLIED CANOPY GASKET TO PREVENT THE CLICKING THAT RESULTS WHEN A GAP OR AN UNEVEN INSTALLATION OCCURS BETWEEN THE CANOPY AND THE CEILING. GASKETS ARE PREAPPLIED TO THE MOTOR WHERE BLADE HOLDERS ARE ATTACHED AS WELL AS TO THE CEILING HANGING BRACKET.



SPEED SWITCH

CONCORD SPEED SWITCHES COME STANDARD WITH A DUAL BRASS COUPLING TO ELIMINATE BREAKAGE OF SWITCH DUE TO REPEATED USE.



REMOTE CONTROL COMPATIBLE

ALL CONCORD FANS ARE REMOTE CONTROL COMPATIBLE. SOME MODELS COME WITH REMOTE CONTROLS INCLUDED.

Standard Features



WARRANTY

ALL CONCORD MOTORS ARE COVERED BY A LIMITED LIFETIME WARRANTY. ALL OTHER COMPONENTS OF OUR FANS, PLUS LIGHT KITS AND ELECTRONICS ARE COVERED BY A 1 YEAR WARRANTY



PATENTED MOTOR COUPLER

THIS PATENTED, UNIQUE DESIGN IS A CONCORD EXCLUSIVE. BESIDE ADDING DECORATIVE QUALITIES TO OUR FANS, THIS STANDARD FEATURE INSURES SAFETY AND STABILITY TO THE FAN WITH DOUBLE THREADS, DOUBLE SAFETY PIN AND SET SCREWS. COLOR IS ALWAYS MATCHED TO THE FAN FINISH.



UL APPROVED

ALL FANS AND LIGHT KITS MEET APPROVAL STANDARDS TO BE UNDERWRITER'S LABORATORY (UL) LISTED.

NOISE FREE SPEED CONTROL METHOD

CONCORD USES PRECISELY MANUFACTURED TRIPLE CAPACITORS WITH UNDERWRITER'S LABORATORY (U.L.) TESTED AND APPROVED QUALITY TO INSURE AND GUARANTEE ALL FANS NOT TO HUM OR BUZZ.

3 SPEED & REVERSIBLE

ALL CONCORD FANS COME EQUIPPED WITH THREE SPEEDS - HIGH, MEDIUM, LOW. AND ALL OF OUR FANS ARE REVERSIBLE TO PROVIDE RE-CIRCULATION OF WARM AIR TRAPPED AT THE CEILING LEVEL DURING THE WINTER SEASON.

LIGHT KIT ADAPTABLE

ALL FANS, WITH EXCEPTION OF THE NAUTIKA, ARE FULLY LIGHT KIT ADAPTABLE. THE DETACHABLE SWITCH HOUSING UNIT MAKES ADDING A LIGHT KIT A QUICK AND EASY INSTALLATION.



BLDC MOTOR

CONCORD BRUSHLESS DC MOTORS ARE OVER 60% MORE ENERGY EFFICIENT REDUCING HEAT AND ELIMINATING NOISE.

Choosing the correct CONCORD support rod


THE FOLLOWING CHART WILL HELP IN CHOOSING THE CORRECT SUPPORT ROD LENGTH WHEN INSTALLING A CEILING FAN IN ROOMS WITH DIFFERENT CEILING HEIGHTS. COUPLERS ARE ALSO AVAILABLE TO CREATE LENGTHS DIFFERENT FROM THE STANDARD LENGTHS STOCKED.

SUPPORT ROD LENGTH	STD	12"	18"	24"	36"	48"	60"	72"
CEILING HEIGHT	8'	9'	10'	11'	12'	13'	14'	15'


Information

The right CONCORD Fan for the right room

All Concord ceiling fans will perform quietly and efficiently in any room size. However, we recommend the following maximum room size. Ceiling fans should be mounted in the center of a room or as close to the center as possible unless using multiple fans in same room.

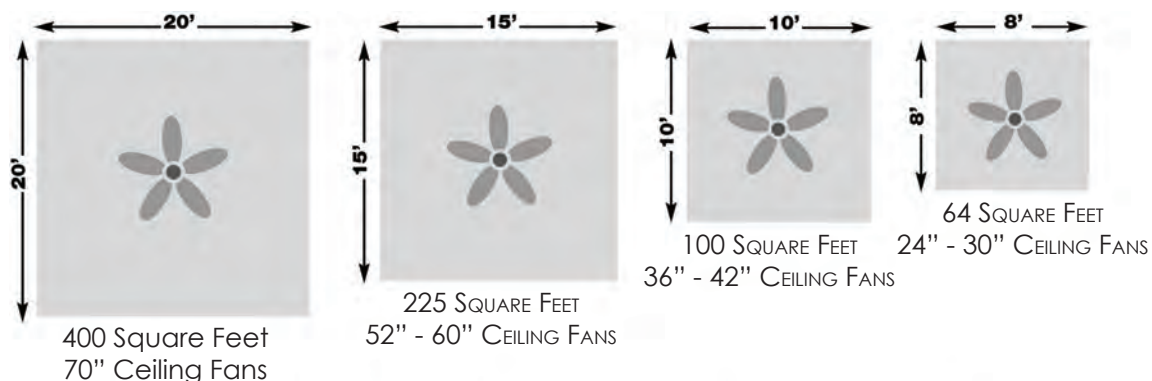


Optional: Room with multiple fan settings

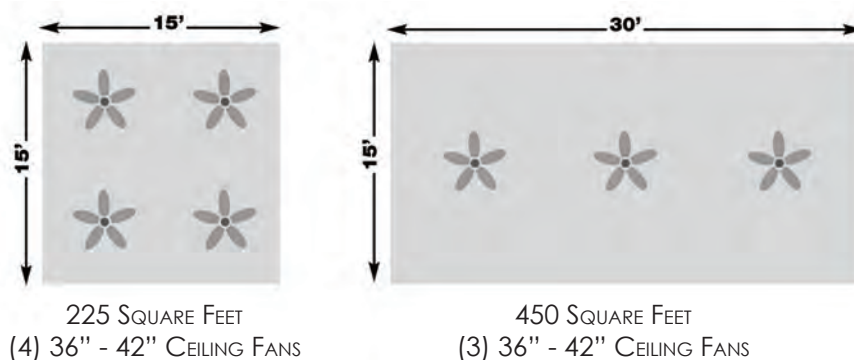


Basic measurements for CONCORD ceiling fan

THE FOLLOWING GUIDE WILL HELP IN CHOOSING THE CORRECT TYPE OF CEILING FAN OR THE POSSIBLE ADDITION OF AN ADAPTER KIT FOR THE INSTALLATION LOCATION YOU HAVE IN MIND. THESE MEASUREMENTS ARE FROM THE CEILING TO THE LOWEST PART OF THE FAN (WITHOUT LIGHT FIXTURE).

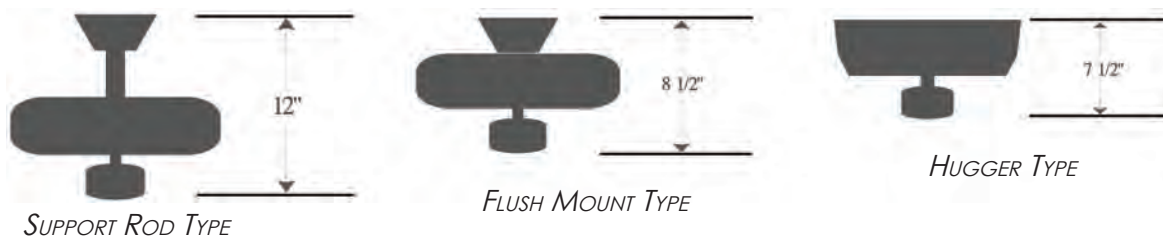

Reference Guide for Concord Fan Dimensions A, B and C on pages 56-59

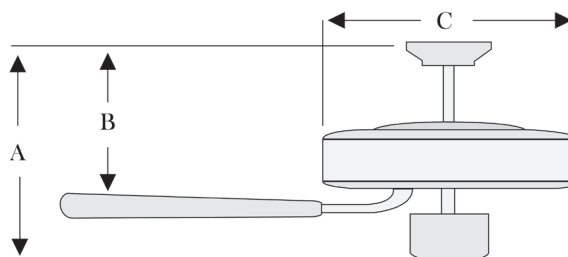

NAME	CONCORD ITEM NUMBER	SUNSET ITEM NUMBER	ROTOR. STATOR O.D	NUMBER OF POLES	NUMBER OF BLADES	BLADE PART NUMBER	LEAD WIRE SIZE	HANGING SYSTEM	DUAL MOUNT ADAP
ARACRUZ (52")	52AC	N/A	188x15	16	5	PB-1032	80"	ROD	N
ARACRUZ (60")	60AC	N/A	212x25	16	5	PB-2560	80"	ROD	N
BOARDWALK (52")	52BW	N/A	172x17	16	5	PB-1053A	80"	DUAL	Y
BROOKPORT (52")	52BR	N/A	172x14	16	5	PB-2752	80"	ROD	N
CALIFORNIA HOME (42")	+42CH	N/A	172x14	16	5	PB-2042	80"	ROD	Y
CALIFORNIA HOME (52")	52CH	CF52242	172x14	16	5	PB-2222	80"	ROD	Y
CAPTOWN (52")	52CP	N/A	188x25	16	6	PB-2010	80"	ROD	Y
DECCA 360 (60")	60DEC	N/A	BLDC165	12	3	PB-13460	80"	ROD	Y
DECORAMA (42")	+42DCO	N/A	188x12	16	5	PB-2042	80"	ROD	Y
DECORAMA (52")	52DCO	N/A	188x12	16	5	PB-2012	80"	ROD	Y
EUROSTAR (52")	52EU	N/A	188x15	16	5	PB-2452	80"	ROD	N
FERNLEAF BREEZE (52")	52FEB	N/A	172x17	16	5	PB-5102A	80"	ROD	Y
FRENCH QUARTER (52")	52FQ	N/A	153x20	16	5	PB-1133	80"	ROD	Y
GARVIN (52")	52GA	N/A	172x20	16	4	PB-2852	80"	ROD	N
HERITAGE DESIGNER (52")	52HED	N/A	153x13	16	5	PB-2023	80"	ROD	Y
HERITAGE FUSION (52")	52HEF	CF52831	153x13	16	5	PB-2023	80"	ROD	Y
HERITAGE FUSION - ENERGY SAVER (52")	52HEF-ES	CF52832	153x16	16	5	PB-2023	80"	ROD	Y
HERITAGE HOME (42")	42HEH	CF42848	153x10	16	5	PB-2223	80"	ROD	Y
HERITAGE HOME (52")	52HEH	CF52836	153x13	16	5	PB-2023	80"	ROD	Y
HERITAGE SQUARE (42")	42HES	CF42877	153x10	16	4	PB-2223	80"	ROD	Y
HERITAGE SQUARE (52")	52HES	CF52878	153x13	16	5	PB-2023	80"	ROD	Y
HERITAGE SQUARE - ENERGY SAVER (52")	52HES-ES	CF52878-ES	153x16	16	5	PB-2023	80"	ROD	Y
HOME AIR (52")	52HA	CF52848	153x16	16	5	PB-2222	80"	ROD	Y
HUGGER (52")	52HUG	CF52142	153*15	16	5	PB-2023	12"	ROD	Y
HUGGER-BULLET (42")	42HUG-Y408	CF42837	153x10	16	4	PB-2223	24"	ROD	Y
HUGGER-SCHOOLHOUSE (42")	42HUG-YG6	CF42839	153x10	16	4	PB-2223	24"	ROD	Y
HUGGER-SCHOOLHOUSE (52")	52HUG-YG8-GU	CF52139	153x13	16	5	PB-2023	24"	ROD	Y

BLADE PITCH	WATTS HIGH LOW	AMP HIGH LOW	RPM HIGH LOW	AIRFLOW	AIRFLOW EFFICIENCY (cfm/watt)	FAN POWER USAGE (watts)	LIGHTING POWER USAGE	DIM. A	DIM. B	DIM. C
14	65/11	0.53/0.23	170/65	5446	84	65	160W	15	14	15 1/2
14	65/11	0.53/0.23	155/60	6500	100	65	160W	16 3/4	14 1/2	17 1/2
14	72/12	0.60/0.20	165/65	5675	79	65	36W	20	16 3/16	12
13	63/9	0.53/0.21	180/75	4570	73	68	120W	19-7/10	12	12 1/5
13	63/9	0.53/0.21	185/75	4568	73	68	N/A	11 1/2	11 3/4	11 3/4
13	63/9	0.53/0.21	175/75	5123	81	61	N/A	11 1/2	12 3/4	11 3/4
16	93/13	0.79/0.20	180/59	5752	62	97	100W	16 1/2	14	12
14	32/2	0.38/0.08	180/50	7200	240	32	100W	17 2/3	12 3/5	7
14	70/25	0.65/0.30	190/80	4678	67	58	N/A	12 1/2	10 1/2	11 1/2
14	70/25	0.65/0.30	180/80	5097	73	61	N/A	13 1/2	12 3/4	11 3/4
13	65/11	0.53/0.23	170/65	6100	94	71	340W	15	14	13
14	68/11	0.58/0.24	175/75	5149	76	66	N/A	15 1/2	13 3/4	9 3/4
14	65/15	0.52/0.20	170/70	5500	85	65	N/A	14 1/8	10 1/2	12 1/4
20	65/11	0.53/0.23	170/65	5500	84	65	120W	14-3/10	8	11
12	59/10	0.50/0.20	170/75	4570	83	59	120W	18 7/8	9 7/8	11
12	60/10	0.50/0.20	170/75	4570	83	59	26W	17	9 7/8	11
13	59/10	0.50/0.20	170/75	5400	98	65	26W	17	9 7/8	11
12	50/10	0.50/0.20	170/75	4051	74	49	180W	18 1/2	9 5/8	8 7/8
12	59/10	0.50/0.20	170/75	4570	83	59	180W	16 7/8	9 7/8	11
12	50/10	0.50/0.20	170/75	4205	76	49	120W	18 1/2	9 5/8	8 7/8
12	55/10	0.50/0.20	170/75	4570	83	59	180W	18 1/8	8 7/8	11
13	55/10	0.50/0.20	170/75	5450	99	62	26W	18 1/8	9 7/8	11
12	55/10	0.50/0.20	170/75	4618	84	63	180W	19 1/2	9 7/8	11
12	55/10	0.50/0.20	170/75	4872	89	60	N/A	8	6 1/5	11
12	50/10	0.50/0.20	190/75	4056	74	49	240W	14	6 1/8	8 3/4
12	50/10	0.50/0.20	190/75	4205	76	49	60W	12	6 1/8	8 3/4
12	55/10	0.50/0.20	170/75	4500	82	52	13W	14	5	11

	CONCORD • FANS SPECIFICATIONS									
	NAME	CONCORD ITEM NUMBER	SUNSET ITEM NUMBER	ROTOR. STATOR O.D	NUMBER OF POLES	NUMBER OF BLADES	BLADE PART NUMBER	LEAD WIRE SIZE	HANGING SYSTEM	DUAL MOUNT ADAP
	LINDEN (52")	52LIN	N/A	153x16	16	5	PB-1054A	80"	ROD	N
	MADISON (52")	52MA	N/A	188x22	16	5	PB-1033	80"	ROD	Y
	MADISON (60")	+60MA	N/A	188x22	16	5	PB-10336	80"	ROD	Y
	MADISON HUGGER (52")	52MAH	N/A	188x25	16	5	PB-1033	12"	FLUSH	N
	MADISON HUGGER (60")	+60MAH	N/A	188x25	16	5	PB-10336	12'	FLUSH	N
	MONTEGO BAY DELUXE (52")	52MBD	CF52148	153x13	16	5	PB-2023	12"	FLUSH	N
	NAUTIKA (44")	+44NA	N/A	172x17	16	5	PB-1044A	80"	ROD	Y
	NAUTIKA (52")	52NA	N/A	172x17	16	5	PB-1052A	80"	ROD	Y
	PILOT DC155 (60")	60PI	N/A	BLDC155	12	3	PB-13360	80"	ROD	N
	PONDEROSA (52")	52PD	N/A	188x15	16	5	PB-2022	80"	ROD	N
	PORCH (44")	+44POR	N/A	153x12	16	5	PB-1044A	80"	ROD	Y
	PORCH (52")	52POR	CF52264	153x12	16	5	PB-1052A	80"	ROD	Y
	PRIMERA (52")	52PR	N/A	BLDC150	12	2 OR 4	PB-4000	24"	FLUSH	N
	PRIMERA (60")	+60PR	N/A	BLDC150	12	2	PB-4060	24"	FLUSH	N
	RICHMOND (52")	52RIC	CF52889	153x13	16	5	PB-2023	80"	ROD	Y
	RICHMOND (42")	42RIC	CF42889	153x10	16	5	PB-2034	80"	ROD	Y
	ROOSEVELT (52")	52RS	N/A	153x17	14	5	PB-2152	80"	ROD	N
	ROOSEVELT (60")	60RS	N/A	212x28	20	5	PB-2160	80"	ROD	Y
	ROOSEVELT (70")	+70RS	N/A	212x28	20	5	PB-2170	80"	ROD	Y
	ROSEMOUNT (52")	52RO	CF52147	153x13	16	5	PB-2023	80"	ROD	N
	SAN MARCOS (52")	52SM	CF52838	153x13	16	5	PB-2023	80"	ROD	Y
	SATURN (52")	52SAT	CF52376	172x17	16	5	PB-2300	80"	ROD	N
	SATURN - EX (52")	52SAX	CF52370	172x17	16	5	PB-2300	80"	ROD	N
	SKYLARK (52")	52SKY	CF52873	153x18	16	3	PB-1030	80"	ROD	Y
	STARGATE (52")	52STG	CF52378	188x15	16	5	PB-2305	80"	ROD	N
	VALORE QUICK CONNECT (52")	52VALQC	CF52880	153x13	16	5	PB-2032	80"	ROD	N
	XIA (52")	52XI	N/A	153x18	16	5	PB-2652	80"	ROD	N

BLADE PITCH	WATTS HIGH LOW	AMP HIGH LOW	RPM HIGH LOW	AIRFLOW	AIRFLOW EFFICIENCY (cfm/watt)	FAN POWER USAGE (watts)	LIGHTING POWER USAGE	DIM. A	DIM. B	DIM. C
12	61/12	0.51/0.23	175/70	4570	83	59	26W	19	12	11 3/8
15	75/10	0.63/0.23	187/58	6527	87	77	N/A	14	10 1/2	12 1/2
16	91/20	0.77/0.37	144/61	6630	75	88	N/A	14	10 1/2	12 1/2
16	91/20	0.77/0.37	144/61	6035	66	85	N/A	12	9 1/2	12 3/4
16	91/20	0.77/0.37	144/61	5868	64	85	N/A	12	9 1/2	12 3/4
12	60/20	0.77/0.37	170/61	4413	48	54	240W	14	6 1/2	11 1/2
14	69/9	0.58/0.21	190/75	5900	86	75	N/A	11	10 1/2	11
14	69/9	0.58/0.21	180/75	5997	87	70	N/A	11	10 1/2	11
14	32/2	0.38/0.08	170/50	6430	201	33	100W	16 1/2	14	6 1/2
14	73/12.5	0.61/0.25	175/70	5572	76	75	N/A	20	16 3/16	12
11	55/10	0.50/0.20	180/75	3135	57	42	N/A	12 7/8	9 7/8	11
11	55/10	0.50/0.20	170/75	5608	102	67	N/A	12 7/8	9 7/8	11
20	28/3.7	0.41/0.03	120/41	6430	200	33	N/A	17	8-2/5	11 4/5
20	28/3.7	0.41/0.03	120/41	6430	200	33	N/A	17	8-2/5	11 4/5
12	59/10	0.50/0.20	170/75	4570	83	59	180W	16-7/8	9-7/8	11
12	50/10	0.50/0.20	170/75	4051	74	49	180W	18-1/2	9-5/8	8-7/8
14	65/11	0.60/0.19	165/60	5574	86	67	N/A	17 7/8	16 1/8	15
15	88/13	0.75/0.28	150/52	7303	83	80.9	N/A	17 7/8	16 1/8	15
15	89/12	0.75/0.28	108/38	7601	86	95	N/A	17 7/8	16 1/8	15
12	59/11	0.60/0.19	165/60	4413	68	62	N/A	14	6 1/2	11 1/2
12	59/10	0.50/0.20	170/75	4730	86	59	N/A	16 7/8	9 7/8	11
13	62/11	0.60/0.18	180/75	6362	103	62	26W	16	9	12 3/4
13	60/11	0.49/0.25	170/60	5000	73	63	100W	16	9	12 3/4
12	56/10	0.55/0.20	170/60	4950	88	56	120W	16	11	10
13	72/12	0.61/0.25	180/75	4856	67	72	100W	16	12	14
12	59/11	0.60/0.18	170/75	4570	77	59	180W	18 7/8	9 7/8	11
12	63/15	0.52/0.26	180/80	5200	86	56	100W	16	12	9

Abbreviations

Ceiling Fan & Lighting Finish

AB = Antique Brass	MB = Matte Black	SC = Swiss Coffee
AP = Aged Pecan	OBB = Oil Brushed Bronze	SN = Satin Nickel
	ORB = Oil Rubbed Bronze	ST = Stainless Steel
BB = Polished Brass		
	RB = Rubbed Bronze	WH = White
GH = Graphite	RI = Rustic Iron	

Blade Set Finish

BF = Black Forest	ELM = Elm	RI = Rustic Iron
BF/RW = Black Forest/ Rosewood	EMN = Elm/Natural Cherry	RW = Rosewood
BK = Black	EW = English Walnut	RWG = Rosewood Gloss
		RW/NM = Rosewood/ Nude Maple
CH = Chrome	GH = Graphite	RW/WP = Rosewood/ Washed Pine
CH/RW = Chrome/Rosewood	HO = Honey	
CHW = Cherrywood		
CHW/DW = Cherrywood/ Dark Walnut	KP = Knotty Pine	SB = Shell Beige
CL = Cream ABS Plastic	LD = Light Oak/Dark Oak	SC = Swiss Coffee
	LO = Light Oak	SO = Silver Oak
DC = Dark Cherry		SO/RW(SR) = Silver Oak/Rosewood
DK = ABS Dark	MB = Matte Black	ST(NP) = Natural Pine
DO = Dark Oak	MED = ABS Light	
DW = Dark Walnut	MH = Mahogany	WB = Weathered Bronze
DW/RW = Dark Walnut/ Rosewood		WH = White
DW/WP = Dark Walnut/ Washed Pine	NA = Natural	WHP = Weathered Pine
DWP = Dark Washed Pine	NC = Natural Cherry	WHW = White & Washed Oak
	NP(ST) = Natural Pine	WP = Washed Pine
	OR = Original	
	ORB = Oil Rubbed Bronze	
	PN = Washed Pine	

Glass Finish

AAS = Antique Amber Scavo
ACS = Aged Cream Scavo
IA = Iridescent Amber
ICA = Icy Amber

Index

+42CH5AB	27	52DCO5WST	25
+42CH5BB	26	52DCO5WWH	25
+42CH5OBB	26	52EU5EOBB	16
+42CH5ORB	26	52EU5EST	16
+42CH5RB	27	52FEB5RI	14
+42CH5SN	26	52FQ5ORB	17
+42CH5ST	27	52GA4EOBB	5
+42CH5WH	27	52HA5ESN	28
+42DCO5WOBB	25	52HA5EWH	28
+42DCO5WORB	25	52HED5EORB	30
+42DCO5WST	25	52HEF5EORB-ES	35
+42DCO5WWH	25	52HEF5ERB-ES	35
42HEH5EORB	36	52HEF5ESN-ES	35
42HEH5ESN	36	52HEF5EWH-ES	35
42HEH5EWH	36	52HEF5SN	33
42HES4ESN	36	52HEF5WH	33
42HES4EWH	36	52HEH5EBB	31
42HUG4BB-Y408	39	52HEH5EORB	31
42HUG4BB-YG6	39	52HEH5ERB	31
42HUG4WH-Y408	39	52HEH5ESN	31
42HUG4WH-YG6	39	52HEH5EWH	31
42RIC5EST	19	52HES5EORB	32
42RO5SN	18	52HES5EORB-ES	34
+44NA5GH	15	52HES5ESN	32
+44NA5ORB	15	52HES5ESN-ES	34
+44NA5WH	15	52HES5EST	32
+44POR5ORB	29	52HES5EWH	32
+44POR5WH	29	52HES5EWH-ES	34
45AD	54	52HUG5BB	38
52AC5ORB	10	52HUG5WH	38
52BR5EORB	8	52HUG5WH-YG8-GU	39
52BW5AP	17	52LIN5EORB	7
52CH5AB	27	52MA5AB	22
52CH5BB	26	52MA5ORB	22
52CH5OBB	26	52MA5WH	22
52CH5ORB	26	52MAH5ORB	23
52CH5RB	27	52MBD5BB	37
52CH5SN	26	52MBD5WH	37
52CH5ST	27	52NA5GH	15
52CH5WH	27	52NA5ORB	15
52CP6ORB	24	52NA5WH	15
52DCO5WOBB	25	52PD5OWL	14
52DCO5WORB	25	52POR5ORB	29

Index

52POR5WH	29
52PR4MB	4
52RIC5EST	19
52RO5SN	18
52RS5OBB	21
52RS5ORB	21
52RS5SN	21
52RS5ST	21
52SAT5ESN	11
52SAT5EWH	11
52SAX5EST	9
52SKY3ESN	12
52SKY3EWH	12
52SM5EST	18
52STG5EST	13
52VALQC5ESN	3
52VALQC5EWH	3
52XI5EST	6
60AC5ORB	10
60CE5EST	19
60DEC3EST	2
+60MA5AB	23
+60MA5ORB	23
+60MA5WH	23
+60MAH5ORB	23
60PI3EST	1
60RS5OBB	20
60RS5ORB	20
60RS5SN	20
60RS5ST	20
+70RS5OBB	20
+70RS5ORB	20
+70RS5SN	20
+70RS5ST	20

A

AC-2030-12	54
------------------	----

D

DR-1000	54
---------------	----

G

G-004	50
-------------	----

G-005	50
G-086	50
G-086ACS	50
G-201	50
G-216	50
G-216FR	50
G-1201	51
G-1201-AAS	51
G-1201-CPS	51
G-1201-EW	51

P

PA-017-S	43
PA-210A-S	40, 41, 46
PA-211A-S	41, 45, 46
PA-250A-S	40
PB-5000A	55
PB-5002A	55
PB-5003	55
PB-5004	55
PD-001	53
PD-002	53
PD-003	53
PD-006	53
PD-007	53
PD-007A	53
PD-011	52
PS-3022	54
PSB-1001	54

R

RM-08	52
RM-08-A	52
RM-08-R	52
RM-08-W	52
RM-09-R	52
RM-100	53
RM-101-S	53
RM-103-S	53

Y

Y-202S	51
Y-202S-AAS	51

Index

Y-202S-WH	51
Y-220A-S.....	40, 41, 43, 44, 45, 46
Y-260A-S.....	40, 41, 42, 43, 44, 45, 46
Y-261A-ES-S-03	48
Y-261A-ES-S-04	48
Y-261A-S-03	48
Y-262A-S.....	41, 43, 44, 47
Y-263A.....	44
Y-263A-ES.....	41, 43, 44, 47
Y-263A-S.....	47
Y-281A-S.....	41
Y-301A-S.....	41, 45, 47
Y-306CG-S	42, 43, 44, 45, 47
Y-308-S-WH	49
Y-309A-S.....	41, 45, 47
Y-360A-S.....	43, 44
Y-386A-S-BB	49
Y-386A-S-RB	49
Y-386A-S-SN.....	49
Y-386A-S-WH	49
Y-396A-S-BB	49
Y-396A-S-WH	49
Y-401CG-S	40, 42, 47
Y-2001-S	48
YG-9CG-S	42, 48
YG-10CG-S	42, 48



A Division of Luminance

West Coast Distribution:
LOS ANGELES, CA

Central Distribution:
HOUSTON, TX

East Coast Distribution:
LONG ISLAND, NY

1945 S. Tubeway Ave.
Los Angeles, CA 90040

www.luminance.us.com

Showrooms:
LOS ANGELES
DALLAS
LAS VEGAS

Customer Service:
800.346.1380
24 Hour Order Fax:
800.346.1381

