


PROGRESS<sup>®</sup>  
LIGHTING




LIGHTING SOLUTIONS

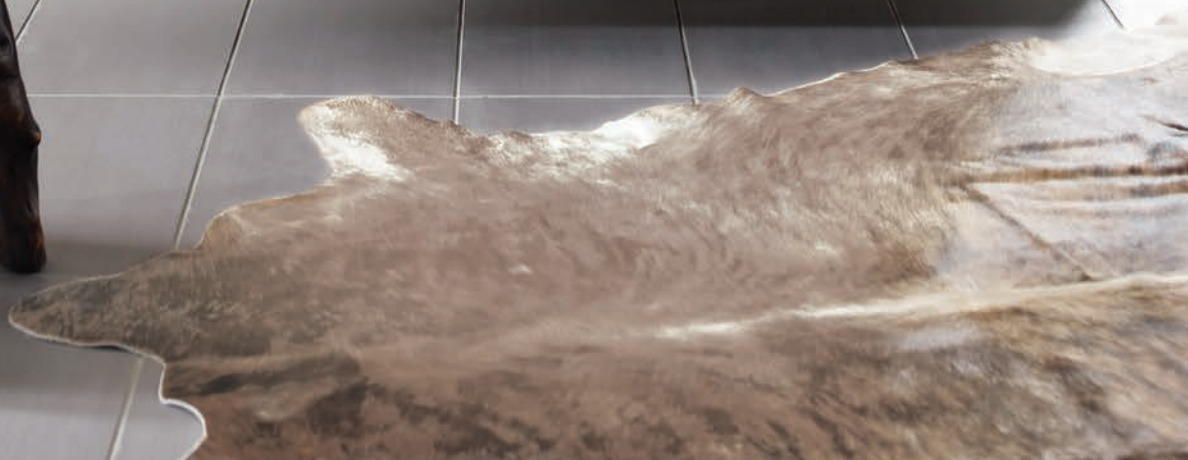

# CONTENTS

2	Lifestyles by Progress Lighting
6	Chandelier, Foyer, Pendants
298	Accessories
302	Close-to-Ceiling
354	Ceiling Fans
374	Bath & Vanity
468	Linear Fluorescent
472	Undercabinet
484	Sconces
500	Directionals
506	Track
524	Outdoor
630	Landscape
644	Recessed
684	Exit Signs
685	Lamps
688	Indexes

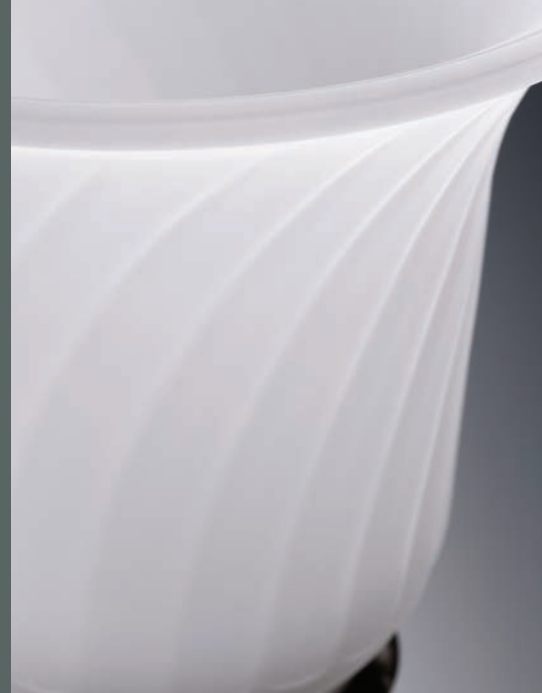



# Lifestyles by Progress Lighting

Imagine the possibilities.  
Imagine your life in Progress.

Progress Lighting offers fixtures that represent quality, beauty and superior performance. Customize and accentuate your favorite rooms by selecting the perfect medley of lighting, infused with your style, for your home.

## MODERN

Modern fashions complement cosmopolitan spaces with chic and sleek accents to offer the ultimate metro vibe. Whether your style is sophisticated and glamorous, or dramatic and charismatic, energize your unique style with fashionably modern style.

CALVEN



BINGO



INDULGE



COMPEL



Mingle



Compass



## Soft Contemporary

Fashions with minimalist undertones are perfect for today's inspired interiors as accessories to refresh with subtle forms and soft shimmer. Transform your home into an oasis with lighting that features a range of softer, more handcrafted modern styles.

Harmony



Status



# Casual

Casual designs represent a palette of authentic, hand-crafted styles. Featuring warm finishes and artistic shades, this style classification has timeless appeal. Turn every room in your home into a loving reflection of your distinctive style.

## Applause



## Greyson



## Flourish



## Residence



## Stroll





*Identity*



## *Classic*

Classic designs conjure fond memories while promising a bright future. Traditional details are refreshed and reinvented to create a room where family and friends love to linger.

*Equinox*



*Archie*



## FORMAL

Crystal, lustrous fabrics and ornamental patterns are incorporated to create refined, livable luxury that is ideal for those who desire a touch of traditional styling. Enhance the special moments in your life with lighting that delivers beauty and grace to your décor.

BLISS



ELINA





CHANDELIERS ARE DRAMATIC LIGHTING FIXTURES THAT ADD PERSONALITY AND FUNCTIONAL ILLUMINATION TO A ROOM. THEY WORK IN VIRTUALLY ANY TYPE OF SPACE AND COME IN A RANGE OF SIZES.

TRADITIONALLY USED OVER DINING TABLES EXCLUSIVELY, CURRENT DECORATING TRENDS ARE EXPANDING THE ROLE OF THESE BEAUTIFUL LIGHTS TO THE FAMILY ROOM, BEDROOMS AND EVEN THE MASTER BATH FOR A MORE GLAMOROUS LIGHTSCAPE.





# THE POINTE

## MINI-PENDANT \*

**P5043-15** Polished Chrome

Size: 6-1/8" sq., 8" ht. Overall ht. w/stem 74"; wire 10'.

Lamp: One medium base lamp, 100w max.

## FIVE-LIGHT PENDANT\*\*

**P5185-15** Polished Chrome

Size: 14-3/8" dia., 8" ht. Overall ht. w/chain 74"; wire 180.

Lamps: Five candelabra base lamps, 60w max.

## SIX-LIGHT CHANDELIER\*\*

**P5192-15** Polished Chrome

Size: 19" dia., 8-5/8" ht. Overall ht. w/chain 74-1/2"; wire 180".

Lamps: Six candelabra base lamps, each 60w max.

## WALL SCONCE

**P7134-15** Polished Chrome

Size: 6-1/8" W., 6-1/2" ht. Extends 5-3/4". H/CTR 3".

Lamp: One candelabra base lamp, 60w max.



Shown: P5157-15 pendant and P7134-15 wall sconce.

\* Includes one 6", four 12" stems and 6 links of chain.

\*\* Includes two 6", eight 12" stems and 2 sets of 6 links of chain.

WITH ALTERNATING CLEAR AND CHAMPAGNE TINTED K9 GLASS ACCENTS, THE POINTE CELEBRATES THE ELEMENT OF SPARKLE THROUGH A SOPHISTICATED AND GLAMOROUS DESIGN. A VARIETY OF FIXTURES CAN BE INTERMINGLED WITHIN THE SAME ENVIRONMENT FOR A CREATIVELY MODERN AND ELEGANT EFFECT.



P5192-15



P5185-15



P7134-15



P5043-15


*Bath & Vanity*

*pg 376*



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# THE POINTE

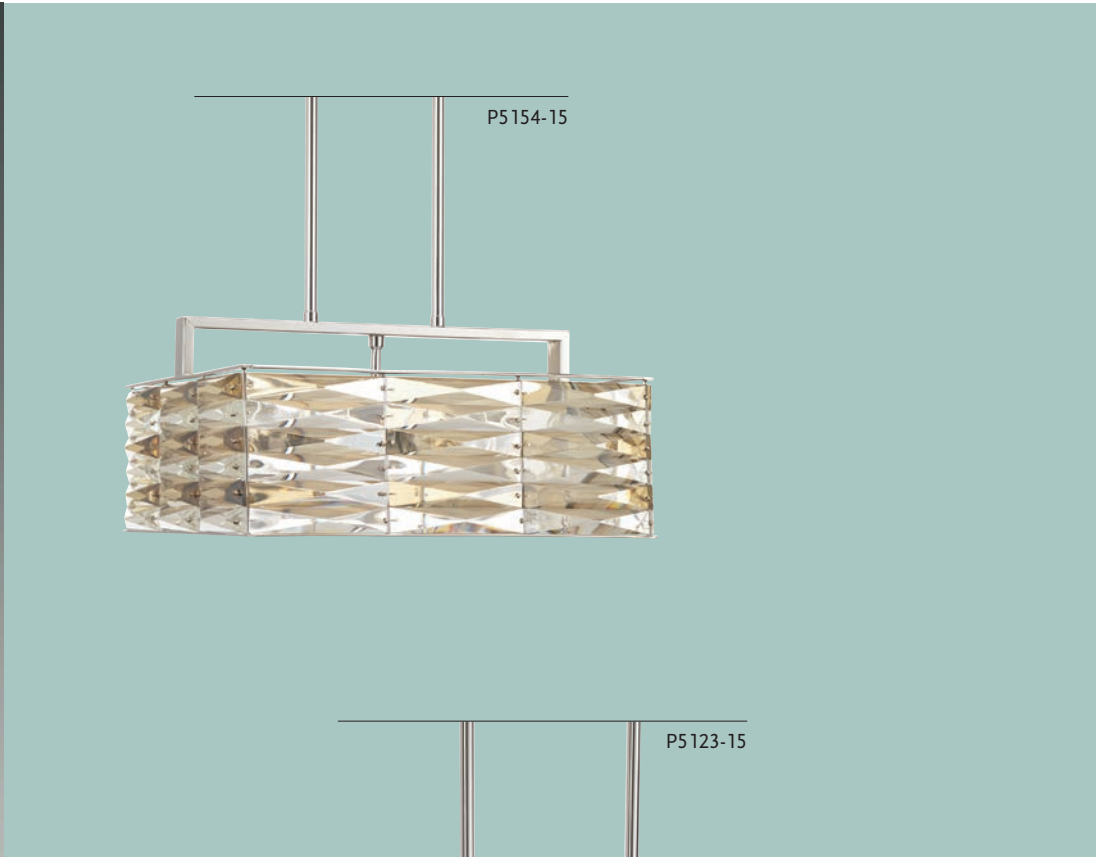


## FOUR-LIGHT PENDANT\*\*

**P5123-15** Polished Chrome  
Size: 29-5/8" L., 6-1/8" W., 7-3/4" ht.  
Overall ht. w/stem 74"; wire 180".  
Lamps: Four candelabra base lamps, 60w max.

## FIVE-LIGHT SQUARE PENDANT\*\*

**P5154-15** Polished Chrome  
Size: 15-1/2" sq., 7-3/4" ht.  
Overall ht. w/stem 74"; wire 180".  
Lamps: Five candelabra base lamps, 60w max.

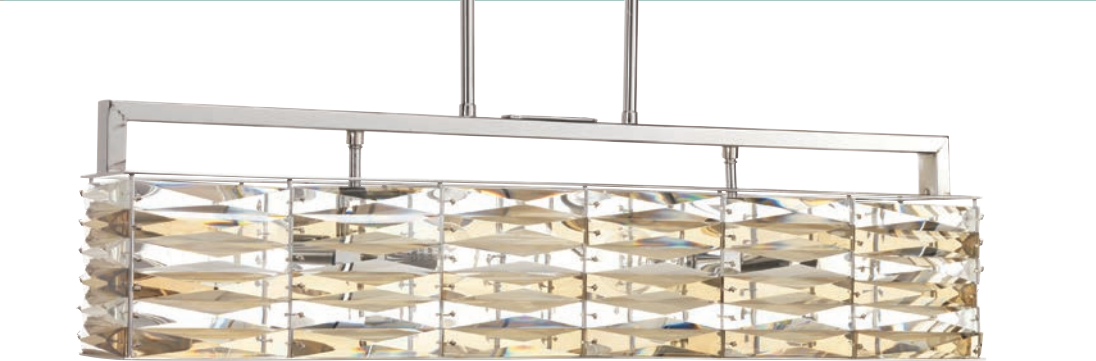


\* Includes one 6", four 12" stems  
and 6 links of chain.

\*\* Includes two 6", eight 12" stems  
and 2 sets of 6 links of chain.



WITH ALTERNATING CLEAR AND CHAMPAGNE TINTED K9 GLASS ACCENTS, THE POINTE CELEBRATES THE ELEMENT OF SPARKLE THROUGH A SOPHISTICATED AND GLAMOROUS DESIGN. A VARIETY OF FIXTURES CAN BE INTERMINGLED WITHIN THE SAME ENVIRONMENT FOR A CREATIVELY MODERN AND ELEGANT EFFECT. AVAILABLE IN A POLISHED CHROME FINISH.

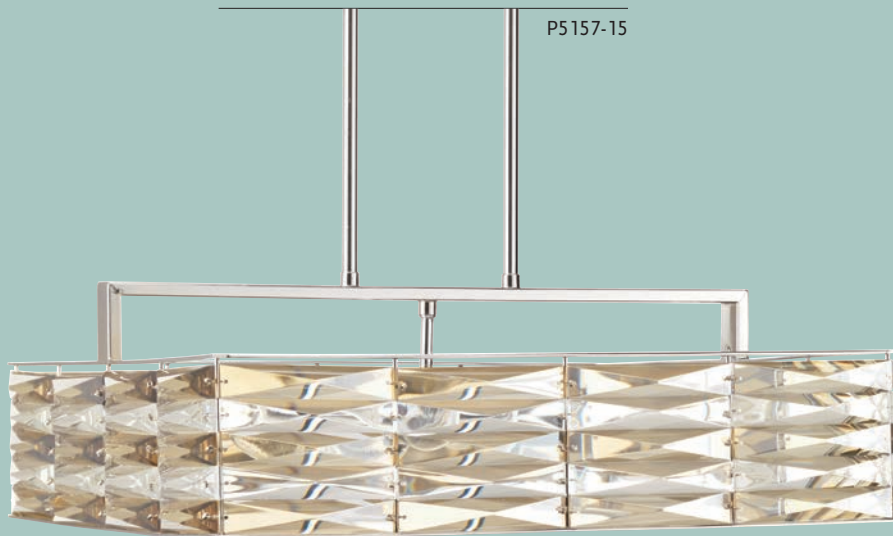

**MINI-PENDANT\***

**P5051-15** Polished Chrome  
Size: 6" dia., 9-3/8" ht. Overall ht.  
w/stem 75"; wire 10'.  
Lamp: One candelabra base  
lamp, 60w max.

**SIX-LIGHT SQUARE  
PENDANT\*\***

**P5157-15** Polished Chrome  
Size: 20" sq., 6-7/8" ht. Overall  
ht. w/stem 73"; wire 180".  
Lamps: Six candelabra base  
lamps, 60w max.

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# ELINA



## WALL BRACKET

**P2099-104** Polished Nickel  
Size: 4-1/2" W., 19" ht.  
Extends 6". H/CTR 9-5/8".  
Lamp: One medium base  
lamp, 100w max.

## FIVE-LIGHT CHANDELIER

**P4651-104** Polished Nickel  
Size: 24-1/2" dia., 23-7/8" ht.  
Overall ht. w/chain 90";  
wire 180".  
Lamps: Five medium base  
lamps, each 100w max.

*Includes one 6", four 12" stems  
and 6 links of chain.*

*Bath & Vanity*

*pg 376*



ELINA SPINS A TRADITIONAL CLASSIC AND MODERN FORM BY EXAGGERATING ITS HEIRLOOM QUALITY DETAILS. THE FIXTURE'S TALL, TRUMPETED OPAL GLASS, K9 GLASS ORB ACCENTS AND POLISHED NICKEL FINISH CREATE THE DISTINCTIVE SILHOUETTE.



**NINE-LIGHT CHANDELIER**

**P4652-104** Polished Nickel

Two-tier.

Size: 30" dia., 30-1/8" ht. Overall  
ht. w/chain 96"; wire 180".

Lamps: Nine medium base  
lamps, each 100w max.

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*



# DAZZLE

P4524-09



## THREE-LIGHT CHANDELIER

**P4523-09** Brushed Nickel

Size: 23" dia., 22" ht. Overall ht. w/chain 96"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4524-09** Brushed Nickel

Size: 26-3/4" dia., 25" ht. Overall ht. w/chain 99"; wire 15'.

Lamps: Five medium base lamps, each 100w max.

## MINI-PENDANT

**P5017-09** Brushed Nickel

Size: 9-3/4" dia., 16" ht. Overall ht. w/chain 90"; wire 10'.

Lamp: One medium base lamp, 100w max.

P5017-09



P4523-09



*Close-to-ceiling*

*pg 302*



[progresslighting.com](http://progresslighting.com)

CLEAR GLASS SHADES BEDAZZLED INSIDE WITH GLISTENING GLASS BEADS EVOKE A 19<sup>TH</sup> CENTURY NOSTALGIA IN THE DAZZLE COLLECTION. ELEGANT AND WELL DRESSED – WITH CERTAIN PANACHE – THE BRUSHED NICKEL FINISH ADDS WARMTH TO EACH FIXTURE WITH SLEEK QUARTZ INSPIRED PRISMS.

**NINE-LIGHT CHANDELIER**

**P4525-09** Brushed Nickel

Two-tier.

Size: 35-3/4" dia., 32" ht. Overall ht. w/chain 106"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

DAZZLE



CLEAR GLASS SHADES BEDAZZLED INSIDE WITH GLISTENING GLASS BEADS EVOKE A 19<sup>TH</sup> CENTURY NOSTALGIA IN THE DAZZLE COLLECTION. ELEGANT AND WELL DRESSED – WITH CERTAIN PANACHE – THE BRUSHED NICKEL FINISH ADDS WARMTH TO EACH FIXTURE WITH SLEEK QUARTZ INSPIRED PRISMS.

#### WALL BRACKET

**P2050-09** Brushed Nickel  
One-light.  
Size: 6-7/8" W., 17-5/8" ht.  
Extends 9-5/8". H/CTR 10-1/4".  
Lamp: One medium base lamp,  
100w max.

#### FIVE-LIGHT INVERTED PENDANT

**P3574-09** Brushed Nickel  
Size: 22" dia., 23-5/8" ht. Overall  
ht. w/chain 98"; wire 15'.  
Lamps: Five candelabra base  
lamps, each 60w max.

#### FOUR-LIGHT FOYER

**P3576-09** Brushed Nickel  
Size: 18" dia., 31-3/8" ht. Overall  
ht. w/chain 105"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.

#### THREE-LIGHT SEMI-FLUSH FOYER

**P3572-09** Brushed Nickel  
Chain and ceiling mounts both  
included.  
Size: 14" dia., 12" ht. Overall ht. w/  
chain 87"; wire 15'.  
Lamps: Three medium base lamps,  
each 100w max.

#### FOUR-LIGHT LINEAR CHANDELIER

**P4526-09** Brushed Nickel  
Size: 36-1/8" L., 6-7/8" W., 23-3/4" ht.  
Overall ht. w/chain 98"; wire 15'.  
Lamps: Four medium base lamps,  
each 100w max.

P3572-09



P4526-09



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*



# Status

## FOUR-LIGHT INVERTED PENDANT

**P3680-15** Polished Chrome  
Size: 22" dia., 28-1/2" ht. Overall  
ht. w/chain 104"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.

## THREE-LIGHT CHANDELIER

**P4140-15** Polished Chrome  
Size: 20" dia., 23-1/8" ht. Overall  
ht. w/chain 97"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4141-15** Polished Chrome  
Size: 28" dia., 23-1/8" ht. Overall  
ht. w/chain 97"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.



P4140-15

P4141-15



P3680-15



Close-to-ceiling

pg 303



ENJOY HIGH STATUS WITH A COLLECTION FULL OF FUN, FEMININITY, GLIMMER AND GLEAM. K-9 GLASS ACCENTS OFFER CRYSTAL-LIKE CLARITY. WHITE FABRIC SHADES PAIRED WITH POLISHED CHROME FINISH. ETCHED GLASS BOTTOM DIFFUSER.

**NINE-LIGHT CHANDELIER**

**P4142-15** Polished Chrome

Two-tier.

Size: 32" dia., 33-1/8" ht. Overall ht. w/chain 155"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

P4142-15



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Status

## FOUR-LIGHT LINEAR CHANDELIER

**P4138-15** Polished Chrome  
Size: 38" L., 6" W., 19-7/8" ht.  
Overall ht. w/chain 94"; wire 15'.  
Lamps: Four medium base lamps,  
each 100w max.

## MINI-PENDANT

**P5031-15** Polished Chrome  
Size: 6" dia., 11-1/8" ht. Overall  
ht. w/chain 77"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



*\* Includes one 6" stem,  
four 12" stems and 6  
links of chain.*

ENJOY HIGH STATUS WITH A COLLECTION FULL OF FUN, FEMININITY, GLIMMER AND GLEAM. K-9 GLASS ACCENT OFFERS CRYSTAL-LIKE CLARITY. WHITE FABRIC SHADES PAIRED WITH POLISHED CHROME FINISH. ETCHED GLASS BOTTOM DIFFUSER.

#### WALL SCONCE

**P2060-15** Polished Chrome

One-light.

Size: 6" W., 15-1/2" ht. Extends 7-3/8". H/CTR 8-3/4".

Lamp: One medium base lamp, 100w max.

#### FOUR-LIGHT FOYER PENDANT

**P3661-15** Polished Chrome

Size: 16" dia., 30-5/8" ht. Overall ht. w/chain 108"; wire 15'.

Lamps: Four medium base lamps, each 100w max.



P2060-15



P3661-15



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# CARESS

## SIXTEEN-LIGHT CHANDELIER

**P4685-104WB** Polished Nickel

Three-tier.

Size: 47" dia., 46" ht. Overall ht. w/stem 181"; wire 15'.

Lamps: Sixteen E12 base krypton lamps, each 60w max., included.

*Note: Weight of fixture exceeds NEC limits for outlet box hanging. Consult professional electrician for proper installation.*

## WALL BRACKET

**P7046-104WB** Polished Nickel

Size: 8" W., 15" ht. Extends 9-1/2". H/CTR 8-7/8".

Lamp: One E12 base krypton lamp, 60w max. included.

P4685-104WB

P7046-104WB



Bath & Vanity

pg 377





CARESS FEATURES A CHIC, SOPHISTICATED FRAME WITH CYLINDRICAL GLASS SHADES. ETCHED GLASS DIFFUSER INSIDE CLEAR WATER GLASS.



P5306-104WB



P4644-104WB

#### THREE-LIGHT CHANDELIER

**P4644-104WB** Polished Nickel  
Size: 22" dia., 24-1/2" ht. Overall ht. w/stem 91"; wire 180".  
Lamps: Three E12 base krypton lamps, each 60w max., included.

#### FIVE-LIGHT CHANDELIER

**P4645-104WB** Polished Nickel  
Size: 27" dia., 22" ht. Overall ht. w/stem 88"; wire 180".  
Lamps: Five E12 base krypton lamps, each 60w max., included.

#### MINI-PENDANT

**P5306-104WB** Polished Nickel  
Size: 8" dia., 12-1/2" ht., Overall ht. w/stem 78"; wire 15".  
Lamp: One E12 base krypton lamp, 60w max., included.



P4645-104WB

*All Caress hanging fixtures include one 6" stem, four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# CARESS

CARESS FEATURES A CHIC, SOPHISTICATED FRAME WITH CYLINDRICAL GLASS SHADES. ETCHED GLASS DIFFUSER INSIDE CLEAR WATER GLASS.



## ONE-LIGHT FOYER PENDANT

**P3946-104** Polished Nickel  
Size: 14" dia., 30" ht. Overall  
ht. w/chain 96"; wire 180".  
Lamp: One medium base lamp,  
100w max.

## ONE-LIGHT FOYER PENDANT

**P3947-104** Polished Nickel  
Size: 18" dia., 44-3/4" ht. Overall  
ht. w/chain 111"; wire 180".  
Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5044-104WB** Polished Nickel  
Chain- or stem-hung mini-pendant.  
Size: 6-3/8" dia., 10-3/4" ht. Overall  
ht w/chain or stem 77"; wire 180".  
Lamp: One E12 base krypton lamp,  
60w max., included.



Close-to-ceiling  
pg 302





P3682-104

**THREE-LIGHT FOYER PENDANT**

**P3682-104** Polished Nickel  
Size: 22" dia., 25-3/4" ht. Overall ht. w/chain 91"; wire 180".  
Lamps: Three medium base lamps, each 100w max.

**NINE-LIGHT CHANDELIER**

**P4646-104WB** Polished Nickel  
Two-tier.  
Size: 36-5/8" dia., 33-5/8" ht. Overall ht. w/chain 100"; wire 180".  
Lamps: Nine E12 base krypton lamps, each 60w max., included.



P4646-104WB

*Includes one 6", four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Identity



P4713-20



P4713-104



P4713-104  
shown with optional  
shades P8930-01



P7155-20



P7155-104



P7155-20  
shown with  
optional shade  
P8931-01

All stem-hung fixtures include one  
6" stem, four 12" stems and  
6 links of chain.

WITH IDENTITY, IT'S ALL IN THE DETAILS. A SPHERICAL ACCENT, SOFT, FLOWING ARMS AND TAPERED CANDLE EMBELLISHMENTS WORK TOGETHER TO CREATE SPECIFIC FOCAL PIECES FOR A FAVORITE ROOM. EXECUTE A CLASSICALLY TAILORED FORM BY CHOOSING A POLISHED NICKEL FINISH OR, FOR A MORE TRADITIONAL FEEL, SELECT THE ANTIQUE BRONZE FINISH.

OPTIONAL FABRIC SHADES IN SUMMER LINEN OR SUMMER WHITE FEATURE CLEAN LINES AND AN INTRIGUING TEXTURE TO CREATE A TOTAL LOOK THAT IS SIMPLE AND SOPHISTICATED.



P4714-20  
shown with optional  
shades P8931-01

#### FIVE-LIGHT CHANDELIER

**P4713-20** Antique Bronze  
**P4713-104** Polished Nickel  
Size: 23-3/4" dia., 18-3/4" ht.  
Overall ht. w/chain 84-3/4";  
wire 180".  
Lamps: Five candelabra  
base lamps, each 60w max.

#### SEVEN-LIGHT CHANDELIER

**P4714-20** Antique Bronze  
**P4714-104** Polished Nickel  
Size: 30-3/4" dia., 20-3/8" ht.  
Overall ht. w/chain 86-3/8";  
wire 180".  
Lamps: Seven candelabra base  
lamps, each 60w max.

#### WALL BRACKET

**P7155-20** Antique Bronze  
**P7155-104** Polished Nickel  
One-light.  
Size: 4-7/8" W., 9" ht. Extends  
6-1/4". H/CTR 3-1/2".  
Lamp: One candelabra base  
lamp, 60w max.

#### OPTIONAL SHADE

**P8930-01** Summer White  
**P8931-01** Summer Linen  
Size: 5-1/2" dia., 4" ht.



P4714-104

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.



# Nissé



OVAL MINI-PENDANT

**P5019-104** Polished Nickel  
Opal glass with clear glass disc.  
Includes one 6" stem, four 12"  
stems and 6 links of chain.  
Size: 5-1/2" L., 3-1/2" W., 6-7/8"  
ht. Overall ht. w/stem 73";  
wire 120".  
Lamp: One medium base lamp,  
100w max.

A STRIKING BLEND OF VINTAGE ELEGANCE AND BOLD SILHOUETTES, NISSÉ IS ADORNED WITH ETCHED OPAL GLASS AND CHUNKY DISCS OF CLEAR GLASS.



P2933-104



P2933-104  
shown with optional  
shades P8704-01

#### WALL BRACKET

**P2933-104** Polished Nickel  
Size: 12" W, 10" ht.  
Extends 6". H/CTR 6".  
Lamps: Two candelabra base  
lamps, each 60w max.

*Shown: P4431-104 oval chandelier  
and P2772-101 Roxbury wall  
sconces.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

Nissé

DROPS OF OPULENT BEADS CASCADE  
DOWN SLEEK CURVED ARMS, FORMING  
A DRAMATIC WATERFALL EFFECT.



Bath & Vanity  
pg 378



Close-to-ceiling  
pg 302





P4139-104  
shown with optional  
shades P8704-01



P4139-104

#### SIX-LIGHT CHANDELIER

**P4139-104** Polished Nickel  
Size: 26" dia., 25-3/8" ht. Overall  
ht. w/chain 100"; wire 15'.  
Lamps: Six candelabra base  
lamps, each 60w max.

#### OVAL CHANDELIER

**P4431-104** Polished Nickel  
Six-light with shade.  
Size: 35-3/4" L., 17-5/8" W.,  
18-1/2" ht. Overall ht. w/chain  
94"; wire 15'.  
Lamps: Six candelabra base  
lamps, each 60w max.

#### NINE-LIGHT CHANDELIER

**P4538-104** Polished Nickel  
Size: 28" dia., 39-5/8" ht. Overall  
ht. w/chain 163"; wire 15'.  
Lamps: Nine candelabra base  
lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4629-104** Polished Nickel  
Opulent beads, clear glass discs  
and white linen shade.  
Size: 24" dia., 32" ht. Overall ht.  
w/chain 107"; wire 180".  
Lamps: Five candelabra base  
lamps, each 60w max.



P4431-104

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

Nissé



P4062-104  
*shown with optional  
shades P8704-01*



P4062-104



P3881-104



P5105-104



P4630-104  
shown with optional  
shades P8704-01

DROPS OF OPULENT BEADS CASCADE  
DOWN SLEEK CURVED ARMS, FORMING  
A DRAMATIC WATERFALL EFFECT.



#### FOUR-LIGHT PENDANT

**P3881-104** Polished Nickel  
Chain and ceiling mounts both  
included.  
Size: 20" dia., 22-1/2" ht. Overall  
ht. w/chain 97"; wire 15'.  
Lamps: Four candelabra base  
lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4062-104** Polished Nickel  
Size: 20" dia., 29-1/4" ht. Overall  
ht. w/chain 104"; wire 15'.  
Lamps: Five candelabra base  
lamps, each 60w max.

#### TWENTY ONE-LIGHT CHANDELIER

**P4630-104** Polished Nickel  
Three-tier.  
Size: 40" dia., 54-1/2" ht. Overall  
ht. w/chain 180"; wire 15'.  
Lamps: Twenty one candelabra  
base lamps, each 60w max.

#### MINI-PENDANT

**P5105-104** Polished Nickel  
Silver chiffon shade surrounded  
by clear acrylic rods. Includes one  
6" stem, four 12" stems and  
6 links of chain.  
Size: 6" dia., 7-3/8" ht. Overall  
ht w/chain or stem 72"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.

P4630-104



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# ROXBURY



P2816-101



P2772-101



WALL BRACKET

**P2772-101** Classic Silver  
Includes both black and white shades.  
Size: 14-7/8" W., 13-5/8" ht.,  
Extends 7-1/2". H/CTR 10-3/4".  
Lamps: Two candelabra base  
lamps, each 60w max.

**TEN-LIGHT FOYER**  
**P2816-101** Classic Silver  
Size: 22" dia., 50" ht. Overall ht.  
w/chain 173"; wire 15'.  
Lamps: Ten candelabra base  
lamps, each 60w max.



A TOUCH OF HOLLYWOOD  
GLAMOUR IN YOUR HOME  
WITH ROXBURY'S SLEEK  
CRYSTAL COLUMNS AND  
BOBECHES.



P4500-101  
shown with optional  
shades P8703-01



P4500-101  
shown with black  
shades (included)

### THREE-LIGHT CHANDELIER

**P4500-101** Classic Silver  
Includes both black and white  
shades.  
Size: 20" dia., 20" ht. Overall ht.  
w/chain 95"; wire 15'.  
Lamps: Three candelabra base  
lamps, each 60w max.

*Shown: P4501-101 chandelier with  
Progress Illumaflex and under  
cabinet.*



P2772-101

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*



# ROXBURY

P4502-101  
shown with black  
shades (included)



P4501-101  
shown with white  
shades (included)



P2726-101

## WALL BRACKET

**P2726-101** Classic Silver  
Two-light. Can mount up  
or down.  
Size: 16-1/2" W., 8-5/8" ht.,  
Extends 7-3/4". H/CTR 4-1/2".  
Lamps: Two medium base  
lamps, each 100w max.

## SIX-LIGHT CHANDELIER

**P4501-101** Classic Silver  
Includes both black and white  
shades.  
Size: 24-5/8" dia., 24" ht. Overall ht.  
w/chain 99"; wire 15'.  
Lamps: Six candelabra base lamps,  
each 60w max.

## TWELVE-LIGHT CHANDELIER

**P4502-101** Classic Silver  
Three-tier. Includes both  
black and white shades.  
Size: 33" dia., 43" ht. Overall ht.  
w/chain 166"; wire 15'.  
Lamps: Twelve candelabra base  
lamps, each 60w max.

## INCLUDED SHADES



**P8701-01** Black paper  
with silver lining  
Size: 6" dia., 4-3/4" ht.



**P8704-01** Off white  
Size: 6" dia., 4-3/4" ht.

## OPTIONAL SHADES



**P8702-01** Blue/green  
Size: 6" dia., 4-3/4" ht.



**P8703-01** Red  
Size: 6" dia., 4-3/4" ht.

A TOUCH OF HOLLYWOOD  
GLAMOUR IN YOUR HOME WITH  
ROXBURY'S SLEEK CRYSTAL  
COLUMNS AND BOBECHES.

#### LINEAR CHANDELIER

**P4503-101** Classic Silver

Two-light.

Size: 33" L., 13-5/8" W., 17-1/8" ht.

Overall ht. w/chain 93"; wire 15'.

Lamps: Two medium base lamps,  
each 100w max.

#### THREE-LIGHT CHANDELIER

**P4504-101** Classic Silver

Size: 19" dia., 19-1/2" ht. Overall

ht. w/chain 94"; wire 15'.

Lamps: Three base G16-1/2  
lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4506-101** Classic Silver

Size: 24-1/4" dia., 23-1/8" ht.

Overall ht. w/chain 98"; wire 15'.

Lamps: Five candelabra base  
G16-1/2 lamps, each 60w max.



Close-to-ceiling

pg 303



Bath & Vanity

pg 379



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.



# ROXBURY



## WALL BRACKET

**P2724-101** Classic Silver

One-light.

Size: 7" W., 9" ht., Extends 8".

H/CTR 4-3/4".

Lamp: One medium base lamp, 100w max.

## FIFTEEN-LIGHT CHANDELIER

**P4508-101** Classic Silver

Three-tier.

Size: 36-1/8" dia., 43" ht. Overall ht. w/chain 166"; wire 15'.

Lamps: Fifteen candelabra base G16-1/2 lamps, each 60w max.



P2724-101

*Bath & Vanity*

pg 379



A TOUCH OF HOLLYWOOD  
GLAMOUR IN YOUR HOME WITH  
ROXBURY'S SLEEK CRYSTAL  
COLUMNS AND BOBECHES.



P2817-101



P4505-101

#### THREE-LIGHT SEMI-FLUSH

**P2817-101** Classic Silver  
Chain and ceiling mounts both included.

Size: 16" dia., 14" ht. Overall ht. w/chain 92"; wire 15'.

Lamps: Three candelabra base G16-1/2 lamps, each 60w max.



P5100-101

#### FOUR-LIGHT CHANDELIER

**P4505-101** Classic Silver

Size: 22" dia., 22" ht.

Overall ht. w/chain 97"; wire 15'.

Lamps: Four medium base lamps, each 100w max.

#### NINE-LIGHT CHANDELIER

**P4507-101** Classic Silver

Two-tier.

Size: 32-1/4" dia., 23-3/4" ht.

Overall ht. w/chain 147"; wire 15'.

Lamps: Nine candelabra base G16-1/2 lamps, each 60w max.



P4507-101

#### MINI-PENDANT

**P5100-101** Classic Silver

Includes two 12" and two 15" stems with 90° swivel.

Size: 7" dia., 10-7/8" ht.

Overall ht. w/stem 67"; wire 10'.

Lamp: One medium base lamp, 100w max.

Close-to-ceiling

pg 303



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.



# NOIR



*Shown: P4209-104 with P8719-01 shades and P2729-104 wall bracket with P8719-01 shades.*





REDISCOVER HOLLYWOOD GLAMOUR  
AND CREATE A DRAMATIC EFFECT WITH  
CRYSTALLINE TEAR DROPS AND OPTIONAL  
BLACK CHIFFON SHADES.

### THREE-LIGHT CHANDELIER

**P4208-104** Polished Nickel  
Size: 16-1/2" dia., 23-1/4" ht.  
Overall ht. w/chain 98"; wire 15'.  
Lamps: Three candelabra base  
lamps, each 60w max.

P4208-104



P4208-104  
shown with optional  
shades P8719-01



P4208-104  
shown with optional  
shade P8772-01



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# NOIR

REDISCOVER HOLLYWOOD GLAMOUR. CREATE A DRAMATIC EFFECT WITH OPTIONAL BLACK CHIFFON SHADES, CRYSTALLINE TEAR DROPS, AND BOBECHES.



## WALL BRACKET

**P2729-104** Polished Nickel

Two-light.

Size: 11-3/8" W., 16-3/4" ht.

Extends 5". H/CTR 7-7/8".

Lamps: Two candelabra base lamps, each 60w max.



P2729-104



**P2729-104**  
*shown with optional  
shades P8719-01*





**SIX-LIGHT CHANDELIER**  
**P4209-104** Polished Nickel  
Size: 28-1/2" dia., 33" ht. Overall  
ht. w/chain 108"; wire 15'.  
Lamps: Six candelabra base  
lamps, each 60w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# NOIR

CRYSTALLINE TEAR DROPS AND ELEGANT  
CENTER COLUMNS IN A POLISHED NICKEL  
FINISH. COMPLETE THE LOOK WITH  
CHIFFON SHADES.



P4210-104



P3400-104



**P3400-104**  
shown with optional  
shade P8772-01

**THREE-LIGHT SEMI-FLUSH**

**P3400-104** Polished Nickel  
Size: 13-1/2" dia., 14-1/2" ht.  
Lamps: Three candelabra base  
lamps, each 60w max.

**NINE-LIGHT CHANDELIER**

**P4210-104** Polished Nickel  
Two-tier.  
Size: 32-1/2" dia., 35-1/2" ht.  
Overall ht. w/chain 158"; wire 15'.  
Lamps: Nine candelabra base  
lamps, each 60w max.



**P4210-104**  
shown with optional  
shades P8719-01



**OPTIONAL SHADE**  
**P8772-01** Sheer black chiffon  
Size: 18" dia., 8-1/2" ht.



**OPTIONAL SHADE**  
**P8719-01** Sheer black chiffon  
Size: 4-1/2" dia., 5" ht.  
7/8" candle fitter.

Optional shades in high contrast  
black chiffon fabric in a sheer wrap  
are ideal for use in elegant dining  
rooms, formal sitting rooms and  
dramatic entryways.

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# FORTUNE



P5034-104

## NINE-LIGHT CHANDELIER

**P4675-104** Polished Nickel  
Size: 31" dia., 15-3/8" ht. Overall ht. w/chain 82"; wire 180".  
Lamps: Nine candelabra base G16-1/2 lamps, each 60w max.

## MINI-PENDANT

**P5007-104** Polished Nickel  
Chain- or stem-hung mini-pendant.  
Size: 8-7/8" dia., 9-3/4" ht. Overall ht. w/chain or stem 76"; wire 120".  
Lamp: One candelabra base G16-1/2 lamp, 60w max.



P5007-104

## THREE-LIGHT PENDANT

**P5034-104** Polished Nickel  
Size: 20-1/4" dia., 15-5/8" ht. Overall ht. w/chain 82"; wire 180".  
Lamps: Three medium base lamps, each 100w max.



P7049-104WB



P4675-104

Close-to-ceiling

pg 304



Bath & Vanity

pg 380





GOOD FORTUNE IS YOUR DESTINY, AS SEEN IN THE TELLER'S MYSTICAL CRYSTAL BALL. FORTUNE FEATURES CLEAR K9 GLASS ORB ACCENTS AND ETCHED OPAL DRUM SHADES IN A POLISHED NICKEL FINISH.



#### THREE-LIGHT CHANDELIER

**P4673-104** Polished Nickel  
Size: 20" dia., 12-1/2" ht. Overall  
ht. w/chain 79"; wire 180".  
Lamps: Three candelabra base  
G16-1/2 lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4674-104** Polished Nickel  
Size: 26" dia., 16-1/2" ht. Overall  
ht. w/chain 83"; wire 180".  
Lamps: Five candelabra base  
G16-1/2 lamps, each 60w max.

#### WALL BRACKET

**P7049-104WB** Polished Nickel  
Size: 5-7/8" W., 8-3/4" ht.  
Extends 7-3/4".  
Lamp: One krypton base lamp,  
60w max. included.

*All stem-hung fixtures on these  
pages include 6" of chain and  
two 6" stems.*



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*



# Indulge



## WALL BRACKET

**P3101-20** Antique Bronze  
Size: 5" W., 8-3/8" ht. Extends  
7-3/8". H/CTR 5-3/4".  
Lamp: One medium base  
lamp, 100w max.

## THREE-LIGHT CHANDELIER\*

**P4088-20** Antique Bronze  
Size: 20" dia., 20-1/2" ht. Overall  
ht. w/stem 86"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER\*

**P4089-20** Antique Bronze  
Size: 26" dia., 22-5/8" ht. Overall  
ht. w/stem 88"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

## NINE-LIGHT CHANDELIER

**P4090-20** Antique Bronze  
Two-tier.  
Size: 34" dia., 31-3/4" ht. Overall  
ht. w/stem 98"; wire 15'.  
Lamps: Nine medium base  
lamps, each 100w max.

\* Includes two 6" stems, one  
12" stem, two 15" stems and  
6 links of chain.

P4089-20

P4090-20

P3101-20

Bath & Vanity

pg 383



progresslighting.com

THE INDULGENT COLLECTION FEATURES CLEAR GLASS SHADES WITH ETCHED DETAILING ON THE INSIDE OF THE GLASS. A SINUOUS ANTIQUE BRONZE FINISHED FRAME HIGHLIGHTS CLEAR BOBECHES AND FINIALS.



P3820-20



P4088-20

**THREE-LIGHT INVERTED PENDANT\***

**P3820-20** Antique Bronze  
Size: 20" dia., 22" ht. Overall ht. w/stem 88"; wire 15'.  
Lamps: Three medium base lamps, each 100w max.

**FOUR-LIGHT LINEAR CHANDELIER\***

**P4188-20** Antique Bronze  
Size: 38" L., 5" W., 22-1/4" ht. Overall ht. w/chain 88"; wire 15'.  
Lamps: Four medium base lamps, each 100w max.

**MINI-PENDANT\*\***

**P5171-20** Antique Bronze  
Size: 5" dia., 8-3/8" ht. Overall ht. w/stem 74"; wire 15'.  
Lamp: One medium base lamp, 100w max.



P5171-20



P4188-20

*\*\*Includes two 6" stems, four 12" stems and 6 links of chain.*

Close-to-ceiling

pg 304



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Harmony

## THREE-LIGHT CONVERTIBLE\*

**P3529-137** Natural Brass  
Size: 12-3/4" dia., 10-1/4" ht.  
Overall ht. w/stem 76-1/2";  
wire 120".  
Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT CONVERTIBLE\*

**P3530-137** Natural Brass  
Size: 15" dia., 10-1/2" ht. Overall  
ht. w/stem 76-3/4"; wire 120".  
Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT CONVERTIBLE\*

**P3531-137** Natural Brass  
Size: 18" dia., 11-1/4" ht. Overall  
ht. w/stem 77-1/2"; wire 120".  
Lamps: Three medium base  
amps, each 100w max.



P4491-137



P3529-137

## THREE-LIGHT CHANDELIER


**P4491-137** Natural Brass  
Size: 26-5/8" dia., 13-5/8" ht.  
Overall ht. w/stem 79-3/4";  
wire 180".  
Lamps: Three medium base  
lamps, each 100w max.

\* Includes hardware for stem or  
ceiling installation.

Close-to-ceiling  
pg 306



CREATE HARMONY IN THE HOME WITH A VARIETY OF FIXTURES THAT OFFER ALTERNATIVE DECORATING SOLUTIONS. IDEAL FOR ALCOVES, ENTRYWAYS, STAIRWAYS AND OTHER COMMONS AREAS, HARMONY FIXTURES CAN STAND ON THEIR OWN OR COORDINATE WITH OTHER PIECES. NATURAL BRASS FINISH WITH SUMMER LINEN SHADE.

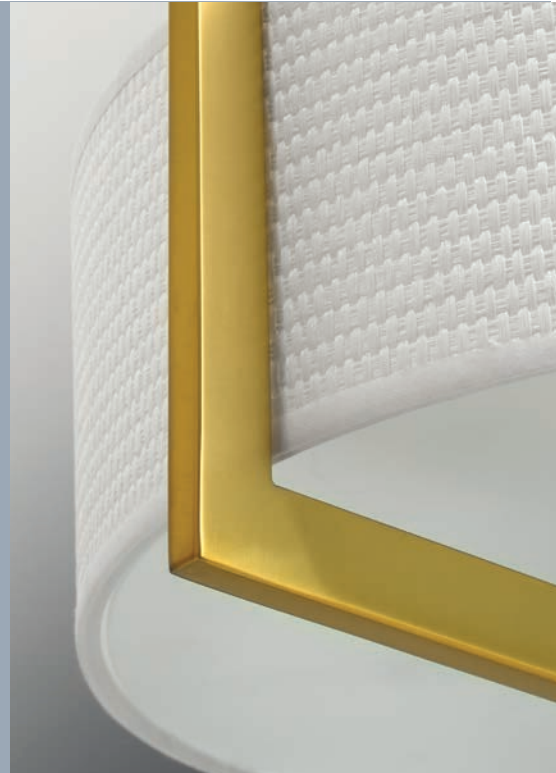

*All fixtures on these pages include one 6", four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Harmony

## TWO-LIGHT CONVERTIBLE\*

**P3557-09** Brushed Nickel

Size: 18" dia., 10-1/4" ht. Overall ht. w/stem 76-1/2"; wire 120".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT CONVERTIBLE\*

**P3558-09** Brushed Nickel

Size: 15" dia., 10-1/2" ht. Overall ht. w/stem 76-3/4"; wire 120".

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CONVERTIBLE\*

**P3559-09** Brushed Nickels

Size: 18" dia., 11-1/4" ht. Overall ht. w/stem 77-1/2"; wire 120".

Lamps: Three medium base lamps, each 100w max.



P4491-09



P3557-09

## THREE-LIGHT CHANDELIER

**P4491-09** Brushed Nickel

Size: 26-5/8" dia., 13-5/8" ht.

Overall ht. w/stem 79-3/4"; wire 180".

Lamps: Three medium base lamps, each 100w max.

\* Includes hardware for stem or ceiling installation.

All fixtures on these pages include one 6", four 12" stems and 6 links of chain.



CREATE HARMONY IN THE HOME WITH A VARIETY OF FIXTURES THAT OFFER ALTERNATIVE DECORATING SOLUTIONS. IDEAL FOR ALCOVES, ENTRYWAYS, STAIRWAYS AND OTHER COMMONS AREAS, HARMONY FIXTURES CAN STAND ON THEIR OWN OR COORDINATE WITH OTHER PIECES. PENDANTS HAVE ETCHED GLASS AND CHANDELIER HAS SUMMER LINEN SHADES.



*Close-to-ceiling*  
pg 306



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Swing

## FLUSH MOUNT

**P3452-20** Antique Bronze

Size: 15" dia., 8-1/2" ht.

Lamps: Three medium base lamps, each 60w max.

## SIX-LIGHT LINEAR CHANDELIER

**P4742-20** Antique Bronze

Size: 34-1/2" L., 4-1/2" W., xx" ht. Overall ht. w/stem 70-1/2"; wire 180".

Lamps: Six medium base lamps, each 60w max.

## FIVE-LIGHT CHANDELIER

**P4744-20** Antique Bronze

Installs facing up or down.

Size: 25" dia., 30" ht. Overall ht. w/chain 68"; wire 180".

Lamps: Five medium base lamps, each 60w max.



*Shown: P4742-20 chandelier.*

A FIXTURE WITH MECHANICAL NATURE – AND UNIQUE AUTHENTICITY – IS WHAT IS PLEASING ABOUT SWING. FIVE-LIGHT HOOP FIXTURE WITH NATURAL BRASS ACCENTS AND STEEL CABLES LENDS ITSELF TO A CRAFTED, WAREHOUSE FORM. THE SIX-LIGHT LINEAR FRAME CAN REVIVE THE LOOK OVER KITCHEN ISLANDS AND BAR AREAS, WHILE ADDING TO A VINTAGE ELECTRIC FEEL.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.



Equinox





PIVOTING INTERLOCKING RINGS  
INSPIRED BY ARMILLARY SPHERES.




#### EIGHT-LIGHT OVAL CHANDELIER

**P3791-20** Antique Bronze  
**P3791-126** Burnished Silver  
 Size: 39" L., 14-1/4" W., 26-3/8" ht. Overall  
 ht. w/chain 150"; wire 15'.  
 Lamps: Eight candelabra base lamps,  
 each 60w max.

#### THREE-LIGHT PENDANT

**P5142-20** Antique Bronze  
**P5142-126** Burnished Silver  
 Size: 10-1/8" dia., 12-1/2" ht.,  
 Overall ht. w/chain 87"; wire 15'.  
 Lamps: Three candelabra base  
 lamps, each 60w max.

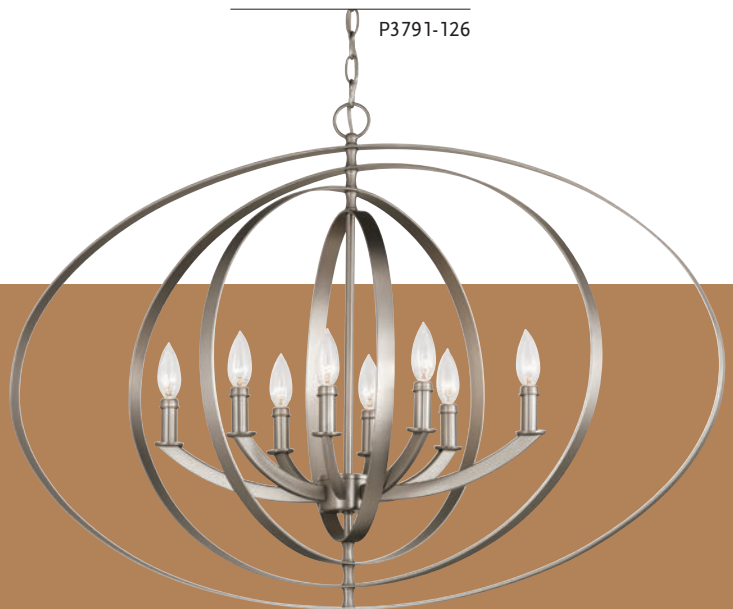

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Equinox

## SIX-LIGHT OVAL CHANDELIER

**P3940-104** Polished Nickel  
Size: 39" L., 14-1/4" W., 24-3/4" ht. Overall ht. w/stem 91"; wire 15'.  
Lamps: Six medium base lamps, each 100w max.

## ONE-LIGHT FOYER

**P7077-104** Polished Nickel  
Size: 11-3/8" dia., 12-1/16" ht., Overall ht. w/chain 78"; wire 10'.  
Lamp: One medium base lamp, 100w max.

## ONE-LIGHT FOYER

**P7078-104** Polished Nickel  
Size: 16" dia., 16-3/4" ht., Overall ht. w/chain 83"; wire 10'.  
Lamp: One medium base lamp, 100w max.

## TWO-LIGHT FOYER

**P7086-104** Polished Nickel  
Size: 27-3/4" dia., 28-1/2" ht., Overall ht. w/chain 95"; wire 10'.  
Lamps: Two medium base lamps, each 100w max.



*All fixtures on this page includes one 6" stem and two 12" stems and 6 links of chain.*

[progresslighting.com](http://progresslighting.com)

PIVOTING INTERLOCKING RINGS  
INSPIRED BY ARMILLARY SPHERES.  
A MODERN OPTION WITH OPAL GLASS  
SHADES IN A POLISHED NICKEL FINISH.



P3889-20



P3827-126



P3889-126

#### FOUR-LIGHT FOYER

**P3827-20** Antique Bronze

**P3827-126** Burnished Silver

Size: 16" dia., 18-3/8" ht. Overall  
ht. w/chain 94"; wire 15'.

Lamps: Four candelabra base  
lamps, each 60w max.

#### SIX-LIGHT FOYER

**P3889-20** Antique Bronze

**P3889-126** Burnished Silver

Size: 27-3/4" dia., 30" ht. Overall  
ht. w/chain 105"; wire 15'.

Lamps: Six candelabra base  
lamps, each 60w max.



P3827-20

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Piedmont

REFRESH YOUR LOOK WITH A CLASSIC VERTICAL STRUCTURE, OPEN ARCHING ROOF AND CENTER LAMP CLUSTERS. ANTIQUE BRONZE OR BURNISHED SILVER FINISH. TRANSITIONAL STYLE FOR HOME INTERIORS.



P3888-20

## FOUR-LIGHT FOYER

**P3884-20** Antique Bronze

**P3884-126** Burnished Silver

Size: 9-7/16" sq., 20-3/8" ht.

Overall ht. w/chain 95"; wire 15'.

Lamps: Four candelabra base lamps, each 60w max.



P3884-126

## EIGHT-LIGHT FOYER

**P3888-20** Antique Bronze

**P3888-126** Burnished Silver

Size: 12-5/16" sq., 34" ht.

Overall ht. w/chain 109"; wire 15'.

Lamps: Eight candelabra base lamps, each 60w max.



P3888-126



P3884-20



# Crestwood

A RENEWED COACH LANTERN STYLE, CLEAR BEVELED GLASS PANELS AND ANTIQUE BRONZE FINISH COMPLEMENT OUTDOOR COVERED SETTINGS OR INTERIOR SPACES.



TWO-LIGHT FOYER

**P3902-20** Antique Bronze  
Size: 10-7/8" sq., 17-1/8" ht.  
Overall ht. w/chain 92"; wire 15'.  
Lamps: Two candelabra base lamps, each 60w max.

**THREE-LIGHT FOYER**  
**P3903-20** Antique Bronze  
Size: 14" sq., 21-1/8" ht.  
Overall ht. w/chain 96"; wire 15'.  
Lamps: Three candelabra base lamps, each 60w max.

**FOUR-LIGHT FOYER**  
**P3904-20** Antique Bronze  
Size: 18" sq., 26-3/4" ht.  
Overall ht. w/chain 102"; wire 15'.  
Lamps: Four candelabra base lamps, each 60w max.



P3902-20



P3903-20



P3904-20

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Bay Court



P5589-09

FOYER PENDANT

**P5589-09** Brushed Nickel  
**P5589-20** Antique Bronze  
Size: 8-3/4" dia., 12-3/4" ht.  
Overall ht w/chain 87"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

Close-to-ceiling  
pg 305



Outdoor  
pg 570





REDISCOVER ANTIQUE NAUTICAL LANTERNS. CAN BE USED IN TRADITIONAL AND NON-TRADITIONAL FASHIONS. IDEAL AS SINGLE PIECES OR MULTIPLES. ETCHED INTERIOR GLASS SURROUNDED BY ETCHED WATER GLASS.



*Shown: P3701-09 pendants.*

FOYER PENDANT

**P3701-09** Brushed Nickel  
**P3701-20** Antique Bronze  
 Size: 11-3/4" dia., 18-1/4" ht.  
 Overall ht. w/chain 94"; wire 15'.  
 Lamp: One medium base lamp, 100w max.



P5589-20



P3701-20



P3701-09

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Compass



## NINE-LIGHT CHANDELIER

**P4707-20** Antique Bronze

Two-tier.

Size: 35-3/4" dia., 28-3/4" ht.

Overall ht. w/stem 95"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.



## MINI-PENDANT

**P5016-20** Antique Bronze

Size: 5-7/8" dia., 9-5/8" ht. Overall ht. w/stem 76"; wire 10'.

Lamp: One medium base lamp, 100w max.

*Hanging fixtures include one 6" stem, four 12" stems and 6 links of chain.*

Close-to-ceiling

pg 321





FIND YOUR FRAME OF REFERENCE WITH THE COMPASS COLLECTION. A STUNNING ANTIQUE BRONZE FINISH WAS SELECTED FOR THE LINEAR DETAILS AND CIRCULAR ACCENTS, WHICH ENCOMPASS A CLEAR ORB, WHILE ETCHED WHITE GLASS SHADES COMPLETE THE FIXTURE.



#### WALL BRACKET

**P2046-20** Antique Bronze  
Size: 4-1/2" W., 11-5/8" ht.  
Extends 6". H/CTR 7-5/8".  
Lamp: One medium base  
lamp, 100w max.

#### FIVE-LIGHT CHANDELIER

**P4706-20** Antique Bronze  
Size: 28" dia., 22-3/8" ht. Overall  
ht. w/stem 88"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.



P2046-20

*Bath & Vanity*

pg 382



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Compass



**THREE-LIGHT INVERTED  
PENDANT**

**P3552-20** Antique Bronze  
Size: 22" dia., 27-1/4" ht. Overall  
ht. w/stem 93"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

**FOUR-LIGHT FOYER**

**P3629-20** Antique Bronze  
Size: 18" dia., 28" ht. Overall ht.  
w/stem 94"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.

*All hanging fixtures  
include one 6" stem, four  
12" stems and 6 links of  
chain.*



FIND YOUR FRAME OF REFERENCE WITH THE COMPASS COLLECTION. A STUNNING ANTIQUE BRONZE FINISH WAS SELECTED FOR THE LINEAR DETAILS AND CIRCULAR ACCENTS, WHICH ENCOMPASS A CLEAR ORB, WHILE ETCHED WHITE GLASS SHADES COMPLETE THE FIXTURE.



#### THREE-LIGHT CHANDELIER

**P4705-20** Antique Bronze  
Size: 19" dia., 18" ht. Overall ht. w/stem 84"; wire 15'.  
Lamps: Three medium base lamps, each 100w max.

#### FOUR-LIGHT LINEAR CHANDELIER

**P4708-20** Antique Bronze  
Size: 38" L., 4" W., 18-3/8" ht. Overall ht. w/chain 84"; wire 15'.  
Lamps: Four medium base lamps, each 100w max.

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Ashbury



## WALL BRACKET

**P2843-134 Silver Ridge**  
Size: 15" W., 14-1/4" ht.  
Extends 8". H/CTR 7-1/4".  
Lamps: Two candelabra base  
lamps, each 60w max.



SLEEK QUARTZ-INSPIRED BOBECHEs CREATE A TRADITIONAL STYLE WITH A MODERN TWIST. THE CIRCULAR DETAILS ARE HIGHLIGHTED BY A SILVER RIDGE FINISH AND TEXTURED ANTIQUE LINEN DOUBLE DRUM SHADES.



FIVE-LIGHT CHANDELIER

**P4462-134** Silver Ridge  
Size: 28" dia., 23-1/2" ht. Overall  
ht. w/chain 99"; wire 15'.  
Lamps: Five candelabra base  
lamps, each 60w max.



*Shown: P4463-134 chandelier with P2843-134 sconce.*



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Ashbury

**THREE-LIGHT LINEAR**  
**P4349-134** Silver Ridge  
Includes two 6", one 12" and two 15" stems with 90° swivel.  
Size: 36" L., 7" W., 21-1/2 " ht.  
Overall ht. w/chain 100"; wire 15'.  
Lamps: Three candelabra base lamps, each 60w max.

**THREE-LIGHT PENDANT**  
**P5056-134** Silver Ridge  
Etched glass diffuser.  
Size: 22" dia., 28-1/2" ht. Overall ht. w/chain 105"; wire 15'.  
Lamps: Three medium base lamps, each 100w max.



*Bath & Vanity*  
pg 381



*Close-to-ceiling*  
pg 307



SLEEK QUARTZ-INSPIRED BOBECHES CREATE A TRADITIONAL STYLE WITH A MODERN TWIST. THE CIRCULAR DETAILS ARE HIGHLIGHTED BY A SILVER RIDGE FINISH AND TEXTURED ANTIQUE LINEN DOUBLE DRUM SHADES.



#### THREE-LIGHT FOYER

**P3932-134** Silver Ridge  
Etched glass diffuser.  
Size: 18" dia., 35-1/2" ht.  
Overall ht. w/chain 111";  
wire 120".  
Lamps: Three medium base  
lamps, each 100w max.

#### MINI-PENDANT

**P5054-134** Silver Ridge  
Includes two 12" and two 15"  
stems with 90°  
Size: 10" dia., 17-1/2" ht.  
Overall ht. w/stem 75"; wire 10'.  
Lamp: One medium  
base lamp, 100w max.

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Ashbury



## OVAL CHANDELIER

**P4463-134 Silver Ridge**

Size: 46" L., 32" W., 32-1/4" ht.

Overall ht. w/chain 107"; wire 15'.

Lamps: Six candelabra base lamps,  
each 60w max.

P4463-134





SLEEK QUARTZ-INSPIRED BOBECHEs CREATE A TRADITIONAL STYLE WITH A MODERN TWIST. THE CIRCULAR DETAILS ARE HIGHLIGHTED BY A SILVER RIDGE FINISH AND TEXTURED ANTIQUE LINEN DOUBLE DRUM SHADES.

#### NINE-LIGHT CHANDELIER

**P4464-134** Silver Ridge

Two-tier.

Size: 36-3/4" dia., 33-1/2" ht.

Overall ht. w/chain 109";

wire 15'.

Lamps: Nine candelabra base lamps, each 60w max.

P4464-134



*Close-to-ceiling*

pg 307



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Clayton



## THREE-LIGHT PENDANT

**P3909-84 Espresso**  
Bottom glass diffuser.  
Size: 20" dia., 21-7/8" ht.  
Overall ht. w/stem 79"; wire 10'.  
Lamp: Three medium base lamps,  
each 100w max.



CLASSIC VINTAGE STYLING MEETS  
MINIMALIST DESIGN. FRESH LOOK USING  
AUTHENTIC ARCHING ARMS. PLEATED  
DRUM SHADES IN CLEAN LINEN FABRIC  
WITH ESPRESSO FINISH. ADJUSTABLE  
TURNKEY DECORATIVE DETAILS.



#### FIVE-LIGHT CHANDELIER

**P4422-84 Espresso**  
Size: 32" dia., 26-1/8" ht. Overall  
ht. w/chain 101"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

#### MINI-PENDANT

**P5256-84 Espresso**  
Size: 8-1/8" dia., 9" ht. Overall  
ht. w/stem 66"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.



All stem-hung fixtures include two  
6" stems, one 12" stem and one  
15" stem with 90° swivel.

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

Shown: P4422-84 chandelier.

Close-to-ceiling

pg 307



# Clayton



FOUR-LIGHT CHANDELIER

**P4421-84 Espresso**  
Size: 28-3/8" dia., 21-3/8" ht.  
Overall ht. w/chain 96"; wire 15'.  
Lamps: Four medium base lamps,  
each 100w max.



*Close-to-ceiling*

*pg 307*





PLEATED DRUM SHADES IN CLEAN LINEN FABRIC WITH ESPRESSO FINISH AND ADJUSTABLE TURNKEY DECORATIVE DETAILS.



#### LINEAR CHANDELIER

**P4400-84** Espresso

Size: 40-3/4" L., 13-1/4" W., 31" ht.  
Overall ht. w/stem 88"; wire 10'.  
Lamps: Two medium base lamps, each 100w max.

#### WALL BRACKET

**P2849-84** Espresso

One-light, portable wall mount with lamp cord. Can be installed as a direct wire or as a plug in. Arm swivels 90°. Low-high switch. Size: 13-1/4" W., 22-3/8" ht. Extends 22-1/8". H/CTR 18-3/8". Lamp: One medium base lamp, 100w max.



**P2849-84**  
shown with wall  
cord (included)

**P2849-84**

All stem-hung fixtures include two 6" stems, one 12" stem and one 15" stem with 90° swivel.

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Haven

THE PERFECT INTERSECTION OF RECTILINEAR FORM AND CONTEMPORARY DETAILS. THE COLLECTION'S ARCHITECTURAL IRON FRAMEWORK IS FINISHED IN BRUSHED NICKEL AND ETCHED WHITE GLASS OR COPPER BRONZE WITH STONEHENGE GLASS.



Shown: P3898-124 linear pendant.



P3898-09



P3921-09

**FOUR-LIGHT LINEAR PENDANT**

**P3898-09** Brushed Nickel

**P3898-124** Copper Bronze

Acrylic bottom diffuser.

Size: 34" L., 8" W., 8-3/4" ht.

Overall ht. w/chain 73"; wire 10'.

Lamps: Four medium base lamps,

each 100w max.

**ONE-LIGHT FOYER**

**P3921-09** Brushed Nickel

**P3921-124** Copper Bronze

Acrylic bottom diffuser.

Includes two sets of stems.

Size: 14" sq., 26-3/4" ht. Overall

ht. w/stem 103"; wire 15'.

Lamp: One medium base lamp,

100w max.



P3921-124



P3898-124

*Includes two 6", one 12", two  
15" stems and six links of chain*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# HELIUM



*Shown: P4185-09 linear chandelier.*



P2901-09

*Bath & Vanity*  
pg 413







SLEEK METAL ARMS SUPPORT A HEAVENLY STRUCTURE. FINELY RIBBED ETCHED GLASS SHADES WITH METAL STUDS.

#### TWO-LIGHT WALL SCONCE


**P2901-09** Brushed Nickel  
Mounts horizontally or vertically.  
Size: 20" W., 6" ht. Extends 5-3/8".  
Lamps: Two medium base lamps,  
each 75w max.

#### LINEAR CHANDELIER

**P4185-09** Brushed Nickel  
Four-light. Etched acrylic diffuser.  
Includes two 12", two 15" stems  
and 6 links of chain.  
Size: 34" L., 8" W., 7-1/4" ht.  
Overall ht. w/chain 73"; wire 10'.  
Lamps: Four medium base  
lamps, each 100w max.



P2901-09

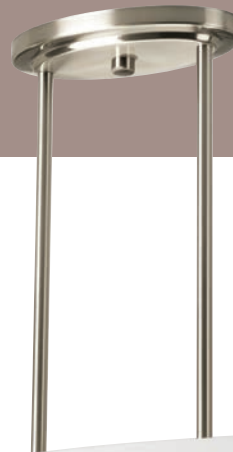

P4185-09



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Mingle



## MINI-PENDANT

**P5038-09** Brushed Nickel

**P5038-20** Antique Bronze

Size: 6" dia., 6-3/8" ht. Overall  
ht. w/chain 78-1/2"; wire 120".

Lamp: One medium base lamp,  
each 100w max.

## THREE-LIGHT PENDANT

**P5155-09** Brushed Nickel

**P5155-20** Antique Bronze

Size: 17" dia., 15-1/4" ht. Overall  
ht. w/chain 81-1/4"; wire 180".

Lamps: Three medium base  
lamps, each 100w max.

## FOUR-LIGHT PENDANT

**P5156-09** Brushed Nickel

**P5156-20** Antique Bronze

Size: 21" dia., 15-1/4" ht. Overall  
ht. w/chain 81-1/4"; wire 180".

Lamps: Four medium base  
lamps, each 100w max.

*Includes one 6" stem, four 12" stems  
and 6 links of chain.*



*Close-to-ceiling  
pg 308*



GO AHEAD. MINGLE WITH YOUR FAVORITE HOME DÉCOR ACCENTS TO FIND A PLACE FOR THIS FUN, FLIRTY FIXTURE. THE ANTIQUE BRONZE FINISH FEATURES A NATURAL PARCHMENT GLASS TO COMPLEMENT THE WARMER FIXTURE. BRUSHED NICKEL FINISH INCLUDES ETCHED PARCHMENT GLASS SHADES.



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Stroll



## WALL BRACKET

**P2132-144** Pebbles

Size: 5" W., 9-1/2" ht. Extends 7-1/2". H/CTR 5-3/4".

Lamp: One medium base lamp, 100w max.

## THREE-LIGHT INVERTED PENDANT

**P3403-144** Pebbles

Size: 19-3/4" dia., 24-3/4" ht. Overall ht. w/chain 98-3/8"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## SIX-LIGHT CHANDELIER

**P4249-144** Pebbles

Size: 27" dia., 23-5/8" ht. Overall ht. w/chain 98-5/8"; wire 15'.

Lamps: Six medium base lamps, each 100w max.



P4249-144



P3403-144



P2132-144

*Bath & Vanity*  
pg 396





ENJOY A FIXTURE ON THE CASUAL – YET ELEGANT – END OF THE DESIGN SPECTRUM WITH STROLL. THE PEBBLES FINISH HIGHLIGHTS AN ARTFULLY SCROLLED FRAME. CLOSE-TO-CEILING AND FOYER FIXTURES ARE COMPLETED BY A FABRIC SHADE AND AN ETCHED GLASS DIFFUSER FOR SOFT ILLUMINATION, WHILE WALL SCONCES, MINI-PENDANT AND CHANDELIERS FEATURE OPAL GLASS.



P2312-144

**TWO-LIGHT SEMI-FLUSH**

**P2312-144** Pebbles

Chain and ceiling mounts both included.

Size: 14" dia., 11-7/8" ht.

Overall ht. w/chain 52"; wire 10'.

Lamps: Three medium base lamps, each 60w max.

**NINE-LIGHT CHANDELIER**

**P4250-144** Pebbles

Two-tier.

Size: 32" dia., 27-5/8" ht. Overall ht. w/chain 150-1/2"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.



P4250-144

**MINI-PENDANT**

**P5033-144** Pebbles

Includes one 6" stem, four 12" stems and 6 links of chain.

Size: 4-3/4" dia., 7-1/4" ht.

Overall ht. w/stem 73-5/8"; wire 10'.

Lamps: Three medium base lamps, each 100w max.



P5033-144

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# BLISS



*Shown: P4038-20 chandelier.*



P2139-20

ENJOY A BLISSFUL CONTRAST BETWEEN CASUAL AND ELEGANT STYLING. OVERSIZED K9 BEADS COMPLEMENT AN ANTIQUE BRONZE IRON FRAME AND FLUTED, CLEAR OPTIC GLASS SHADES.

#### WALL BRACKET

**P2139-20** Antique Bronze

Size: 6-3/4" W., 13" ht. Extends 9-5/8". H/CTR 6-3/4".

Lamp: One candelabra base lamp, 60w max.

#### THREE-LIGHT CHANDELIER

**P4032-20** Antique Bronze

Size: 18" dia., 19-7/8" ht. Overall ht. w/stem 95"; wire 15'.

Lamps: Three candelabra base lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4038-20** Antique Bronze

Size: 25-3/4" dia., 24" ht. Overall ht. w/stem 99"; wire 15'.

Lamps: Five candelabra base lamps, each 60w max.

#### MINI-PENDANT

**P5165-20** Antique Bronze

Includes one 6" stem, four 12" stems and 6 links of chain.

Size: 6-3/4" dia., 6-3/8" ht.

Overall ht. w/stem 72"; wire 10'.

Lamp: One candelabra base lamp, 60w max.



P4032-20



P4038-20



P5165-20

*Bath & Vanity*

pg 396



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Club



## FIVE-LIGHT INVERTED PENDANT

**P3625-20** Antique Bronze  
Size: 22" dia., 23-5/8" ht. Overall  
ht. w/chain 98"; wire 15'.  
Lamps: Five candelabra base  
lamps, each 60w max.

## THREE-LIGHT CHANDELIER

**P4527-20** Antique Bronze  
Size: 23" dia., 22" ht. Overall ht.  
w/chain 96"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4528-20** Antique Bronze  
Size: 26-3/4" dia., 25" ht. Overall  
ht. w/chain 99"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.





CLUB'S DECORATIVE DESIGN IS BOLD AND HANDSOME WITH ANTIQUE BRONZE IRON SCROLLS. CHISELED ANGULAR PRISMS BOAST A NATURAL PAINTED DISTRESSED PATTERN AND ACCENT THE LIGHTLY TEA-STAINED GLASS SHADES.

#### NINE-LIGHT CHANDELIER

**P4529-20** Antique Bronze

Two-tier.

Size: 35-3/4" dia., 32" ht. Overall ht. w/chain 106"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.



P4529-20



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Club



## THREE-LIGHT SEMI-FLUSH

**P3615-20** Antique Bronze  
Chain and ceiling mounts both included.  
Size: 14" dia., 12" ht. Overall ht. w/stem 87"; wire 15'.  
Lamp: Three medium base lamps, each 100w max.

## FOUR-LIGHT FOYER

**P3626-20** Antique Bronze  
Size: 18" dia., 31-3/8" ht. Overall ht. w/chain 105"; wire 15'.  
Lamps: Four medium base lamps, each 100w max.

## MINI-PENDANT

**P5039-20** Antique Bronze  
Size: 9-3/4" dia., 16" ht. Overall ht. w/chain 90"; wire 10'.  
Lamp: One medium base lamp, 100w max.

CLUB'S DECORATIVE DESIGN IS BOLD AND HANDSOME WITH ANTIQUE BRONZE IRON SCROLLS. CHISELED ANGULAR PRISMS BOAST A NATURAL PAINTED DISTRESSED PATTERN AND ACCENT THE LIGHTLY TEA-STAINED GLASS SHADES.

#### WALL BRACKET

**P2055-20** Antique Bronze  
Size: 6-7/8" W., 17-5/8" ht.  
Extends 9-5/8". H/CTR 10-1/4".  
Lamp: One medium base lamp,  
100w max.

#### FOUR-LIGHT LINEAR CHANDELIER

**P4552-20** Antique Bronze  
Size: 36-1/8" L., 6-7/8" W., 23-3/4"  
ht. Overall ht. w/chain 98"; wire 15'.  
Lamps: Four medium base lamps,  
each 100w max.



P2055-20



P4552-20



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# FIorentino



## THREE-LIGHT FOYER

**P2879-77** Forged Bronze

Size: 15-7/8" dia., 35-7/8" ht.  
Overall ht. w/chain 111"; wire 15'.  
Lamps: Three candelabra base  
lamps, each 60w max.

## WALL BRACKET

**P2951-77** Forged Bronze

Size: 6-3/8" W., 14-1/2" ht.  
Extends 7-3/4". H/CTR 9".  
Lamp: One candelabra base  
lamp, 60w max.

## TWELVE-LIGHT CHANDELIER

**P4411-77** Forged Bronze

Two-tier.  
Size: 32-7/8" dia., 37-5/8" ht.  
Overall ht. w/chain 161"; wire 15'.  
Lamps: Twelve candelabra base  
lamps, each 60w max.





STYLIZED LEAF AND TASSELS, CLEAR SEEDED  
GLASS, CHAMPAGNE DRIP GLASS CANDLES  
WITH BROWN AND BLACK TONES AND  
CASUAL GOLDEN HIGHLIGHTS.

#### SIX-LIGHT CHANDELIER

**P4409-77** Forged Bronze

Size: 27-3/8" dia., 26-1/8" ht.

Overall ht. w/chain 101"; wire 15'.

Lamps: Six candelabra base  
lamps, each 60w max.

#### SIX-LIGHT CHANDELIER

**P4410-77** Forged Bronze

Size: 29-3/8" dia., 32-7/8" ht.

Overall ht. w/chain 108"; wire 15'.

Lamps: Six candelabra base  
lamps, each 60w max., and three  
candelabra base lamps, each 40w  
max., in bowl.

#### MINI-PENDANT

**P5140-77** Forged Bronze

Includes two 12" and two 15"  
stems with 90° swivel.

Size: 11-1/8" dia., 11-1/2" ht.

Overall ht. w/stem 69"; wire 10'.

Lamp: One medium base lamp,  
100w max.

P4410-77



P4409-77



P5140-77



*Close-to-ceiling*

*pg 308*



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Santiago



## WALL BRACKET

**P2752-80** Forged Black  
**P2752-102** Roasted Java  
Size: 6-3/8" W., 11" ht.  
Extends 7", H/CTR 7-7/8".  
Lamp: One medium base lamp,  
100w max.



P2752-102



P2752-80

CASUAL DETAILS MEET RUSTIC DESIGN. FEATURING SPIRALED DETAILING, SCROLLED ARMS, ROMANTIC JASMINE MIST GLASS, SUBTLE FORGED IRON TWISTS, AND FORGED BLACK OR ROASTED JAVA FINISHES.



P4587-102

#### FIVE-LIGHT CHANDELIER

**P4587-80** Forged Black  
**P4587-102** Roasted Java  
 With one-light downlight (can be turned on/off with integral column switch).  
 Size: 24-1/4" dia., 23" ht. Overall ht. w/chain 98"; wire 15'.  
 Lamps: Five candelabra base lamps, each 60w max. and one 50w R-20 lamp in downlight.



P4587-80

Shown: P4588-102 chandelier and P2753-102 wall brackets.

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Santiago

THREE-LIGHT CHANDELIER  
**P4586-80** Forged Black  
**P4586-102** Roasted Java  
Size: 18" dia., 17" ht. Overall ht. w/chain 92"; wire 15'.  
Lamps: Three candelabra base lamps, each 60w max.

OVAL CHANDELIER  
**P4588-80** Forged Black  
**P4588-102** Roasted Java  
Size: 37-7/8" L., 26" W. Overall ht. w/chain 99"; wire 15'.  
Lamps: Six candelabra base lamps, each 60w max.



*Bath & Vanity*  
pg 394





CASUAL DETAILS MEET RUSTIC DESIGN.  
FEATURING SPIRALED DETAILING,  
SCROLLED ARMS, ROMANTIC JASMINE  
MIST GLASS, SUBTLE FORGED IRON  
TWISTS, AND FORGED BLACK OR ROASTED  
JAVA FINISHES.



#### MINI-PENDANT

**P5076-80** Forged Black

**P5076-102** Roasted Java

Includes two 12" and two 15"  
stems with 90° hang straight.

Size: 6-1/4" w., 15-1/4" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base  
base lamp, 100w max.



*Close-to-ceiling*

pg 310



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Santiago



## THREE-LIGHT SEMI-FLUSH

**P3839-80** Forged Black

**P3839-102** Roasted Java

Chain and ceiling mounts both included.

Size: 19-7/8" dia., 14-1/4" ht.

Overall ht. w/chain 92"; wire 15'.

Lamps: Three medium base lamps, each 75w max.

## THREE-LIGHT FOYER

**P3840-80** Forged Black

**P3840-102** Roasted Java

Size: 14-1/4" dia., 27-1/8" ht.

Overall ht. w/chain 103"; wire 15'.

Lamps: Three candelabra base lamps, each 60w max.





CASUAL DETAILS MEET RUSTIC DESIGN. FEATURING SPIRALED DETAILING, SCROLLED ARMS, ROMANTIC JASMINE MIST GLASS, SUBTLE FORGED IRON TWISTS, AND FORGED BLACK OR ROASTED JAVA FINISHES.

**WALL BRACKET**

**P2753-80** Forged Black

**P2753-102** Roasted Java

Size: 14" W., 11" ht.

Extends 7". H/CTR 7-7/8".

Lamps: Two medium base lamps, each 100w max.

**NINE-LIGHT CHANDELIER**

**P4179-80** Forged Black

**P4179-102** Roasted Java

Two-tier.

Size: 32" dia., 29-1/4" ht. Overall ht. w/chain 104"; wire 15'.

Lamps: Nine candelabra base lamps, each 60w max.



P2753-80



P2753-102



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Greyson



## THREE-LIGHT CHANDELIER

**P4709-31** Black

Size: 14-1/4" dia., 15-7/8" ht.  
Overall ht. w/chain 90"; wire 15'.  
Lamps: Three candelabra base  
lamps, each 60w max.



P4709-31

## SIX-LIGHT CHANDELIER

**P4711-31** Black

Size: 26" dia., 23-1/2" ht. Overall ht.  
w/chain 98-3/4"; wire 15'.  
Lamps: Six candelabra base lamps,  
each 60w max.



P4711-31



A BLACK IRON FRAME WITH TWIST ELEMENTS TAKES CENTER STAGE IN GREYSON. CANDLE FIXTURES NESTLE INSIDE THIS RUSTIC PIECE FOR A STRONG AND BOLD, YET CASUAL, FEEL.



#### SIX-LIGHT FOYER

**P3577-31** Black

Size: 18-1/4" dia., 31-1/4" ht.  
Overall ht. w/chain 106-1/2";  
wire 15'.

Lamps: Six candelabra base  
lamps, each 60w max.

#### FIVE-LIGHT CHANDELIER

**P4710-31** Black

Size: 21-1/2" dia., 20-1/2" ht.  
Overall ht. w/chain 96"; wire 15'.

Lamps: Five candelabra base  
lamps, each 60w max.

#### WALL SCONCE

**P7158-31** Black

Size: 4" W., 8-1/4" ht. Extends  
4-3/4". H/CTR 4-1/8".

Lamp: One candelabra base  
lamp, 60w max.



P7158-31

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Le Jardin



FIVE-LIGHT CHANDELIER

**P4201-84 Espresso**  
Size: 26" dia., 26" ht. Overall ht. w/chain 101"; wire 15'.  
Lamps: Five medium base lamps, each 100w max.



*Bath & Vanity*

*pg 402*





Shown: P4202 chandelier and P2967 wall brackets.

FORGED IRON WITH DELICATE, ROMANTIC DETAILING AND AN ESPRESSO FINISH. WEATHERED SANDSTONE GLASS AND SUBTLE LEAF ELEMENTS.



#### TWO-LIGHT FOYER

**P2841-84** Espresso

Chain and ceiling mounts both included.

Size: 16-1/8" dia., 16" ht.

Overall ht. w/chain 91";

wire 15'.

Lamps: Two medium base lamps, each 100w max.

#### WALL BRACKET

**P3012-84** Espresso

Size: 7" W., 11-1/2" ht. Extends

9-1/2". H/CTR 4-1/2".

Lamp: One medium base lamp, 100w max.



#### THREE-LIGHT CHANDELIER

**P4200-84** Espresso

Size: 20" dia., 18" ht. Overall ht.

w/chain 93"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

#### SIX-LIGHT CHANDELIER

**P4202-84** Espresso

Size: 28" dia., 32" ht. Overall ht.

w/chain 107"; wire 15'.

Lamps: Six medium base lamps, each 100w max.



Close-to-ceiling

pg 311



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.



# Le Jardin

## ONE-LIGHT FOYER

**P3684-84** Espresso

Size: 11" dia., 24" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamp: One medium base  
lamp, 100w max.

## THREE-LIGHT FOYER

**P3686-84** Espresso

Size: 18" dia., 36" ht. Overall  
ht. w/chain 111"; wire 15'.

Lamps: Three medium base  
lamps, each 75w max.

## NINE-LIGHT FOYER

**P4203-84** Espresso

Size: 32" dia., 39" ht. Overall  
ht. w/chain 162"; wire 15'.

Lamps: Nine medium base  
lamps, each 100w max.



P3686-84



P3684-84



P4203-84



P4147-84

FORGED IRON WITH DELICATE, ROMANTIC DETAILING AND AN ESPRESSO FINISH. WEATHERED SANDSTONE GLASS AND SUBTLE LEAF ELEMENTS.



#### SIXTEEN-LIGHT CHANDELIER

**P4147-84 Espresso**

Three-tier.

Size: 42" dia., 51" ht. Overall ht. w/chain 174"; wire 15'.

Lamps: Sixteen medium base lamps, each 75w max.

*Note: Weight of fixture exceeds NEC limits for outlet box hanging. Consult professional electrician for proper installation.*

#### MINI-PENDANT

**P5083-84 Espresso**

Includes two 12" and two 15" stems with 90° swivel.

Size: 7" dia., 17" ht.

Overall ht. w/stem 74"; wire 10'.

Lamp: One medium base lamp, 100w max.

#### PENDANT

**P5122-84 Espresso**

Size: 15-3/4" dia., 19-1/4" ht.

Overall ht. w/chain 94"; wire 15'.

Lamp: One medium base lamp, 150w max.

P5122-84



P5083-84



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Applause



## INVERTED PENDANT

**P3560-20** Antique Bronze  
Size: 19-5/8" dia., 21-3/8" ht.  
Overall ht. w/stem 96-1/2"; wire 15'.  
Lamp: One medium base lamp,  
100w max.

## THREE-LIGHT CHANDELIER

**P4035-20** Antique Bronze  
Size: 20" dia., 15-3/4" ht. Overall  
ht. w/chain 91"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4036-20** Antique Bronze  
Size: 24-1/2" dia., 24-5/8" ht.  
Overall ht. w/chain 99"; wire 15'.  
Lamps: Five medium base lamps,  
each 100w max.



Close-to-ceiling

pg 309



AN INSPIRING PERFORMANCE. A HEART-STOPPING SHOW. A MOTIVATING SPEECH. AUDIENCES DEMONSTRATE APPRECIATION AND PRAISE FOR ELEMENTS THAT ARE WORTHY OF ACCLAIM. APPLAUSE IS A FINE AND HANDSOME COLLECTION THAT FEATURES NATURAL PARCHMENT GLASS. APPLAUSE IS COMPRISED OF TRADITIONAL IRON FORMS IN AN ANTIQUE BRONZE FINISH.



#### WALL BRACKET

**P2095-20** Antique Bronze  
Mounts up or down.  
Size: 6-3/8" W., 11-1/2" ht.  
Extends 9". H/CTR 6-7/8".  
Lamp: One medium base lamp, 100w max.

#### SEMI-FLUSH CONVERTIBLE

**P3507-20** Antique Bronze  
Size: 15-3/4" dia., 12" ht.  
Overall ht. w/chain 51"; wire 10'.  
Lamps: Two medium base lamps, each 100w max.

#### NINE-LIGHT CHANDELIER

**P4037-20** Antique Bronze  
Two-tier.  
Size: 29-1/4" dia., 31-3/4" ht. Overall ht. w/chain 145-1/2"; wire 15'.  
Lamps: Nine medium base lamps, each 100w max.

#### MINI-PENDANT

**P5010-20** Antique Bronze  
Includes one 6" stem, four 12" stems and 6 links of chain.  
Size: 7" dia., 6-1/2" ht.  
Overall ht. w/stem 72-1/2"; wire 10'.  
Lamp: One medium base lamp, 100w max.

Bath & Vanity

pg 397



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Melbourne



## SIX-LIGHT CHANDELIER

**P4060-84** Espresso

Size: 28" dia., 27" ht. Overall ht. w/chain 102"; wire 15'.

Lamps: Six medium base lamps, each 100w max.

## NINE-LIGHT CHANDELIER

**P4061-84** Espresso

Two-tier.

Size: 31" dia., 31-1/2" ht. Overall ht. w/chain 106"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.





P4268-84

BRING HAPPINESS WITH DELICATE, CHARMING HIGHLIGHTS AND SCULPTED WATERMARK GLASS. ESPRESSO FINISH WITH A BLEND OF RICH DARK BROWN TONES AND BIRDCAGE SCROLL IRONWORK.

## FIFTEEN-LIGHT CHANDELIER

**P4268-84 Espresso**

Three-tier.

Size: 42-1/2" dia., 51" ht. Overall ht. w/chain 174"; wire 15'.

Lamps: Fifteen medium base lamps, each 75w max.

*Note: Weight of fixture exceeds NEC limits for outlet box hanging. Consult professional electrician for proper installation.*

*Close-to-ceiling*

pg 312

*Bath & Vanity*

pg 395



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Melbourne

## FIVE-LIGHT CHANDELIER

**P4055-84** Espresso

Size: 23-7/8" dia., 24-1/8" ht.  
Overall ht. w/chain 99"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

## FOUR-LIGHT CHANDELIER

**P4059-84** Espresso

Size: 19-3/4" dia., 15-7/8" ht.  
Overall ht. w/chain 91"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.

## THREE-LIGHT FOYER

**P4266-84** Espresso

Glass top diffuser.  
Size: 20-1/2" dia., 36" ht. Overall  
ht. w/chain 159"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.



P4059-84



P4266-84



P4055-84



P3606-84

RICH ESPRESSO FINISH WITH  
SCULPTED WATERMARK GLASS.



P2918-84



P5001-84



P5000-84

#### WALL BRACKET

**P2918-84** Espresso  
Mounts up or down.  
Size: 6-3/8" W., 11-1/2" ht.  
Extends 9". H/CTR 6-7/8".  
Lamp: One medium base lamp,  
100w max.

#### ONE-LIGHT FOYER

**P3606-84** Espresso  
Size: 22" dia., 29" ht. Overall  
ht. w/chain 104"; wire 15'.  
Lamp: One medium base  
lamp, 100w max.

#### MINI-PENDANT

**P5000-84** Espresso  
Includes two 12" and two  
15" stems with 90° swivel.  
Size: 9" dia., 9-1/8" ht.  
Overall ht. w/stem 66"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

#### PENDANT

**P5001-84** Espresso  
Includes two 12" and two  
15" stems with 90° swivel.  
Size: 14" dia., 10" ht.  
Overall ht. w/stem 67"; wire 10'.  
Lamp: One medium base lamp,  
150w max.

Bath & Vanity

pg 395



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Flourish



## THREE-LIGHT CHANDELIER

**P4803-72** Cognac

Size: 17-3/4" dia., 23-3/4" ht.

Overall ht. w/chain 99"; wire 180".

Lamps: Three candelabra base lamps, each 40w max.

## FIVE-LIGHT CHANDELIER

**P4805-72** Cognac

Size: 25-7/8" dia., 33-1/4" ht.

Overall ht. w/chain 108-1/2"; wire 180".

Lamps: Five candelabra base lamps, each 40w max.



LUXURIOUS ELEMENTS BALANCED BY NATURAL TONES COMBINE TO MAKE ANY HOME DÉCOR DESIGN THRIVE. CONTRASTING ARTISANAL GLASS AND AUTUMNAL LINEN SHADE HIGHLIGHTED BY A CONTRASTING WOVEN PATTERN. CLEAR GEOMETRIC GLASS SHAPES COMINGLE WITH SMALLER BEADS AND LARGER PENDANTS – BOTH FEATURING A RICH, SMOKY COLORATION.



P5151-72



P7142-72



P4803-72



#### FOUR-LIGHT PENDANT

**P5151-72** Cognac

Size: 20-1/4" dia., 27" ht.

Overall ht. w/chain 102"; wire 180".

Lamps: Four candelabra base lamps, each 60w max.

#### WALL BRACKET

**P7142-72** Cognac

Size: 5" W., 13-3/8" ht.

Extends 6-7/8". H/CTR 4-1/2".

Lamp: One candelabra base lamp, 40w max.

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*



Shown: P4100-46 linear chandelier.

# Arts & Crafts

## WALL BRACKET

**P2900-46** Weathered Bronze  
Can mount up or down.  
Size: 8-1/2" W., 10-1/4" ht. Extends 9-3/4".  
Lamp: One medium base lamp, 100w max.

## THREE-LIGHT FOYER

**P3613-46** Weathered Bronze  
Etched glass bottom. Hinged, perforated, glass top cover for easy relamping.  
Size: 10" sq., 14" ht. Overall ht. w/chain 87-3/4"; wire 15'.  
Lamps: Two medium base lamps, each 100w max., and one R-20 downlight, 50w max.

## LINEAR CHANDELIER

**P4100-46** Weathered Bronze  
Size: 34" L., 12" W., 19-5/8" ht. Overall ht. w/chain 94"; wire 15'.  
Lamps: Two medium base lamps, each 100w max.

## FOUR-LIGHT CHANDELIER

**P4102-46** Weathered Bronze  
Size: 30" dia., 19-5/8" ht. Overall ht. w/chain 58"; wire 15'.  
Lamps: Four medium base lamps, each 100w max.

## MINI-PENDANT

**P5020-46** Weathered Bronze  
18" stem with 72" chain.  
Size: 8-1/2" sq., 27-3/4" ht., Overall ht. w/chain 102"; wire 15'.  
Lamp: One medium base lamp, 100w max.

P5020-46



REJUVENATE YOUR MOOD WITH RUSTIC FEATURES, WEATHERED BRONZE FINISH, AND CAST FIXTURES WITH LIGHT HONEY ART GLASS AND MICA ACCENT PANELS.



P4102-46



P3613-46



P4100-46

*Bath & Vanity*

*pg 401*



*Close-to-ceiling*

*pg 310*



P2900-46

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.



# Riverside



## WALL BRACKET

**P3092-88** Heirloom  
Size: 4-3/4" W., 8" ht. Extends  
6-1/8". H/CTR 4-1/8".  
Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5002-88** Heirloom  
Includes two 12" and two  
15" stems with 90° swivel.  
Size: 4-3/4" dia., 7-3/4" ht.  
Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



P3092-88

*Shown: P4229-88 linear chandelier.*

*Bath & Vanity*  
pg 400





RIVERSIDE FEATURES A HEIRLOOM FINISH WITH LIGHT TOPAZ GLASS, A RELAXING ETCHED WAVE PATTERN, AND SHADES WITH CASUAL UNDERTONES. FORGED LINEAR STRUTS.

P4214-88

### THREE-LIGHT CHANDELIER

**P4212-88** Heirloom

Size: 18-7/8" dia., 17-1/2" ht.

Overall ht. w/chain 92"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

### NINE-LIGHT CHANDELIER

**P4214-88** Heirloom

Two-tier.

Size: 28" dia., 30-1/2" ht.

Overall ht. w/chain 105"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.



Close-to-ceiling

pg 311



P4212-88



P5002-88



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Riverside

## SIX-LIGHT CHANDELIER

**P4213-88** Heirloom

Size: 24" dia., 20-3/8" ht.

Overall ht. w/chain 95"; wire 15'.

Lamps: Six medium base lamps, each 100w max.



## LINEAR CHANDELIER

**P4229-88** Heirloom

Size: 14" W., 36" L., 24-7/8" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Two medium base lamps, each 150w max.



RIVERSIDE FEATURES A HEIRLOOM FINISH WITH LIGHT TOPAZ GLASS, A RELAXING ETCHED WAVE PATTERN AND FORGED LINEAR STRUTS.

### THREE-LIGHT FOYER

**P3519-88** Heirloom

Size: 18-3/4" dia., 22-3/4" ht.  
Overall ht. w/chain 98"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

### FIFTEEN-LIGHT CHANDELIER

**P4245-88** Heirloom

Three-tier.  
Size: 40-3/4" dia., 38" ht. Overall  
ht. w/chain 161"; wire 10'.  
Lamps: Fifteen medium base  
lamps, each 75w max.

*Note: Weight of fixture exceeds NEC  
limits for outlet box hanging. Consult  
professional electrician for proper  
installation.*



Fan Light Kit

pg 364



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Kensington



FOUR-LIGHT FOYER  
**P3464-09** Brushed Nickel  
**P3464-77** Forged Bronze  
Size: 18" dia., 29" ht. Overall ht.  
w/chain 104"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.

*Close-to-ceiling*  
pg 313





CASUAL, COMFORTABLE COLLECTION FEATURING SCROLLED ARMS WITH TRUMPET-SHAPED SWIRLED GLASS SHADES. OFFERED IN A FORGED BRONZE FINISH WITH FROSTED CARAMEL GLASS, OR BRUSHED NICKEL FINISH WITH ETCHED GLASS.



P4238-77



P4238-09

**FIVE-LIGHT CHANDELIER**

**P4238-09** Brushed Nickel

**P4238-77** Forged Bronze

Size: 27" dia., 26-1/2" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Five medium base lamps, each 100w max.

*Bath & Vanity*

pg 406



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Kensington

CASUAL, COMFORTABLE COLLECTION FEATURING SCROLLED ARMS WITH TRUMPET-SHAPED SWIRLED GLASS SHADES. OFFERED IN A FORGED BRONZE FINISH WITH FROSTED CARAMEL GLASS, OR BRUSHED NICKEL FINISH WITH ETCHED GLASS.



P4314-09

## TWELVE-LIGHT CHANDELIER

**P4314-09** Brushed Nickel

**P4314-77** Forged Bronze

Three-tier.

Size: 34" dia., 42" ht.

Overall ht. w/chain 166"; wire 15'.

Lamps: Twelve medium base lamps, each 100w max.



P4314-77



P4288-09



P4288-77

#### WALL BRACKET

**P2783-09** Brushed Nickel

**P2783-77** Forged Bronze

Size: 6" dia., 9.5" ht.

Extends 7".

Lamp: One medium base lamp, 100w max.

#### NINE LIGHT CHANDELIER

**P4288-09** Brushed Nickel

**P4288-77** Forged Bronze

Two-tier.

Size: 31-1/2" dia., 32" ht.

Overall ht. w/chain 155"; wire 15'.

Lamps: Nine medium based lamps, each 100w max.



P2783-77



P2783-09

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Kensington



## THREE-LIGHT FOYER

**P3532-09** Brushed Nickel

**P3532-77** Forged Bronze

Size: 21-7/8" dia., 28-1/4" ht.

Overall ht. w/chain 103";

wire 15'.

Lamps: Three medium base

lamps, each 100w max.

## MINI-PENDANT

**P5141-09** Brushed Nickel

**P5141-77** Forged Bronze

Includes two 6", one 12" and

two 15" stems with 90° swivel.

Size: 7" dia., 7-1/2" ht.

Overall ht. w/stem 65"; wire 10'.

Lamp: One medium base lamp,

100w max.



CASUAL, COMFORTABLE COLLECTION  
FEATURING SCROLLED ARMS WITH  
TRUMPET-SHAPED SWIRLED GLASS  
SHADES. OFFERED IN A FORGED BRONZE  
FINISH WITH FROSTED CARAMEL GLASS,  
OR BRUSHED NICKEL FINISH WITH  
ETCHED GLASS.

ONE-LIGHT FOYER

**P3678-09** Brushed Nickel

**P3678-77** Forged Bronze

Chain and ceiling mounts both  
included.

Size: 11-3/8" dia., 13" ht.

Overall ht. w/chain 92"; wire 15'.

Lamp: One medium base lamp,  
100w max.



P3678-77



P3678-09

THREE-LIGHT CHANDELIER

**P4158-09** Brushed Nickel

**P4158-77** Forged Bronze

Size: 18" dia., 20-1/2" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.



P4158-09



P4158-77

*Fan light kit*

pg 366



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Torino

## ONE-LIGHT FOYER PENDANT

**P5144-09** Brushed Nickel

**P5144-77** Forged Bronze

Stem and ceiling mounts both included. Includes one 6", one 12" and two 15" stems with 90° swivel. Size: 13-1/8" dia., 15-1/8" ht.

Overall ht. w/stem 66"; wire 10'. Lamp: One medium base lamp, 100w max.

## MINI-PENDANT

**P5153-09** Brushed Nickel

**P5153-77** Forged Bronze

Includes two 12" and two 15" stems with 90° swivel.

Size: 7-1/2" dia., 11" ht. Overall ht. w/stem 68"; wire 10'.

Lamp: One medium base lamp, 100w max.

*Shown: P4417-77 chandelier,  
P7181-77 wall sconce and  
P3843-77 foyer.*



Ceiling Fan

pg 364



progresslighting.com

CHARMING SQUARED SCROLLS  
AND SLEEK YET CASUAL CURVES.  
TEA STAINED GLASS COMPLEMENTS  
FORGED BRONZE FINISH AND THE  
ETCHED WHITE GLASS ENHANCES  
THE BRUSHED NICKEL FINISH.



P4416-77



P4416-09



#### WALL BRACKET

**P2881-09** Brushed Nickel

**P2881-77** Forged Bronze

Size: 7" W., 9-1/4" ht. Extends 9".

Lamp: One medium base lamp,  
100w max.

#### FIVE-LIGHT CHANDELIER

**P4416-09** Brushed Nickel

**P4416-77** Forged Bronze

Size: 26-1/8" dia., 24-3/4" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Five medium base lamps,  
each 100w max.

#### WALL SCONCE

**P7181-09** Brushed Nickel

**P7181-77** Forged Bronze

Size: 9-1/2" W., 6-3/4" ht.

Extends 4-3/4". H/CTR 2-7/8".

Lamp: One medium base  
lamp, 100w max.



P2881-77



P2881-09



P7181-77



P7181-09

# Torino



P3824-77



P3824-09



P4405-09



P4405-77

## THREE-LIGHT FOYER PENDANT

**P3824-09** Brushed Nickel

**P3824-77** Forged Bronze

Size: 19-3/4" dia., 32-1/2" ht. Overall  
ht. w/chain 108"; wire 15'.

Lamps: Three medium base lamps,  
each 100w max.

## THREE-LIGHT CHANDELIER

**P4405-09** Brushed Nickel

**P4405-77** Forged Bronze

Size: 19-1/8" dia., 19-1/8" ht.

Overall ht. w/chain 94"; wire 15'.

Lamps: Three medium base lamps,  
each 100w max.

Bath & Vanity

pg 403





CHARMING SQUARED SCROLLS  
AND SLEEK YET CASUAL CURVES.  
TEA STAINED GLASS COMPLEMENTS  
FORGED BRONZE FINISH AND THE  
ETCHED WHITE GLASS ENHANCES  
THE BRUSHED NICKEL FINISH.

THREE-LIGHT CHANDELIER  
WITH ONE-LIGHT BOWL

**P4415-09** Brushed Nickel

**P4415-77** Forged Bronze

Size: 24" dia., 24-1/8" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max. and one  
medium base lamp, 75w max.

SIX-LIGHT CHANDELIER  
WITH THREE-LIGHT BOWL

**P4417-09** Brushed Nickel

**P4417-77** Forged Bronze

Size: 28-5/8" dia., 29-7/8" ht.

Overall ht. w/chain 105"; wire 15'.

Lamps: Six medium base lamps,  
each 100w max. and three medium  
base lamps, 75w each.



Close-to-ceiling

pg 314



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Torino



## THREE-LIGHT FOYER

**P3843-09** Brushed Nickel

**P3843-77** Forged Bronze  
Chain and ceiling mounts  
both included.

Size: 18" dia., 18-1/2" ht. Overall  
ht. w/chain 94"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

## TWELVE-LIGHT FOYER

**P4419-09** Brushed Nickel

**P4419-77** Forged Bronze  
Three-tier.

Size: 34" dia., 42-1/8" ht.  
Overall ht. w/chain 165";  
wire 15'.

Lamps: Twelve medium base  
lamps, each 100w max.

CHARMING SQUARED SCROLLS  
AND SLEEK YET CASUAL CURVES.  
TEA STAINED GLASS COMPLEMENTS  
FORGED BRONZE FINISH AND THE  
ETCHED WHITE GLASS ENHANCES  
THE BRUSHED NICKEL FINISH.

**THREE-LIGHT FOYER PENDANT**

**P3847-09** Brushed Nickel

**P3847-77** Forged Bronze

Size: 22" dia., 27" ht. Overall ht.  
w/chain 102"; wire 15'.

Lamps: Three medium base lamps,  
each 100w max.

**NINE-LIGHT CHANDELIER  
WITH THREE-LIGHT BOWL**

**P4418-09** Brushed Nickel

**P4418-77** Forged Bronze

Two-tier.

Size: 32" dia., 32-5/8" ht. Overall  
ht. w/chain 155"; wire 15'.

Lamps: Nine medium base  
lamps, each 100w max. and  
three medium base lamps,  
each 75w max.

P3847-77



P4418-77



P4418-09

P3847-09



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Legend



## FIVE LIGHT CHANDELIER

**P4271-09** Brushed Nickel

**P4271-20** Antique Bronze

Size: 28" dia., 25-3/8" ht. Overall ht. w/chain 100"; wire 15'.

Lamps: Five medium base lamps, each 100w max.



THE CRAFTSMANSHIP OF SCULPTED GLASS IN THIS STUNNING FIXTURE DEFINES THE LEGEND COLLECTION. SMOOTH ON THE OUTSIDE, WITH A SUBTLE, NATURE-INSPIRED PATTERN ON THE INSIDE, THIS ELEGANT FIXTURE APPEARS TO COME ALIVE WHEN ILLUMINATED. SLIGHTLY OVERSIZED SHADES COMPLEMENT THE ARCHING ARMS.



P2315-09



P2315-20



P4270-09



P4270-20

#### WALL BRACKET

**P2087-09** Brushed Nickel

**P2087-20** Antique Bronze

Size: 7" W., 8-3/4" ht. Extends 8", H/CTR 5-1/4".

Lamp: One medium base lamp, 100w max.

#### SEMI-FLUSH CONVERTIBLE

**P2315-09** Brushed Nickel

**P2315-20** Antique Bronze

Size: 14-1/2" dia., 11-3/8" ht.

Overall ht. w/chain 52-3/8";

wire 10'.

Lamps: Two medium base lamps, each 100w max.

#### THREE LIGHT CHANDELIER

**P4270-09** Brushed Nickel

**P4270-20** Antique Bronze

Size: 22" dia., 18" ht. Overall ht.

w/chain 93"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



P2087-09



P2087-20

*Close-to-ceiling*

*pg 312*



*Bath & Vanity*

*pg 398*



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Legend

## NINE LIGHT CHANDELIER

**P4272-09** Brushed Nickel

**P4272-20** Antique Bronze

Two-tier.

Size: 33" dia., 30-7/8" ht.

Overall ht. w/chain 152-3/4";

wire 15'.

Lamps: Nine medium base  
lamps, each 100w max.

## MINI PENDANT

**P5032-09** Brushed Nickel

**P5032-77** Forged Bronze

Includes one 6" stem, four 12"  
stems and 6 links of chain.

Size: 7" dia., 7-1/2" ht.

Overall ht. w/stem 72"; wire 10'.

Lamp: One medium base  
lamp, 100w max.



THE CRAFTSMANSHIP OF SCULPTED GLASS IN THIS STUNNING FIXTURE DEFINES THE LEGEND COLLECTION. SMOOTH ON THE OUTSIDE, WITH A SUBTLE, NATURE-INSPIRED PATTERN ON THE INSIDE, THIS ELEGANT FIXTURE APPEARS TO COME ALIVE WHEN ILLUMINATED. SLIGHTLY OVERSIZED SHADES COMPLEMENT THE ARCHING ARMS.



P3505-09



P4272-09



**THREE-LIGHT INVERTED PENDANT**

**P3505-09** Brushed Nickel  
**P3505-20** Antique Bronze  
 Size: 16-5/8" dia., 21-7/8" ht.  
 Overall ht. w/chain 96-1/4"; wire 15'.  
 Lamps: Three medium base lamps, each 100w max.

*Bath & Vanity*

pg 398



# Merge

## INVERTED PENDANT

**P3446-20** Antique Bronze

Size: 19-3/4" dia., 22-5/8" ht.  
Overall ht. w/stem 88-5/8";  
wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT CHANDELIER

**P4315-20** Antique Bronze

Size: 20" dia., 16" ht. Overall ht.  
w/stem 82"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4316-20** Antique Bronze

Size: 27-1/2" dia., 24-5/8" ht.  
Overall ht. w/stem 90-1/2";  
wire 15'.

Lamps: Five medium base  
lamps, each 100w max.





WITH MERGE, A CLEAN AND MODERN SILHOUETTE BLENDS WITH OPAL GLASS SHADES AND IRON ELEMENTS TO CREATE A FRESH FIXTURE COLLECTION. THE DESIGN DETAILS ARE EXECUTED EFFORTLESSLY AND FEATURE AN ANTIQUE BRONZE FINISH.



**NINE-LIGHT CHANDELIER**

**P4317-20** Antique Bronze

Two-tier.

Size: 32" dia., 30-1/4" ht.

Overall ht. w/stem 96-1/4";

wire 15'.

Lamps: Nine medium base lamps, each 100w max.



**MINI PENDANT**

**P5055-20** Antique Bronze

Size: 5-1/4" dia., 9-1/4" ht.

Overall ht. w/stem 75-1/4";

wire 10'.

Lamp: One medium base lamp, 100w max.

*All stem-hung fixtures include one 6" stem, four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Cantata



P5139-77

## MINI-PENDANT

**P5139-09** Brushed Nickel  
**P5139-77** Forged Bronze  
Includes two 12" and two 15"  
stems with 90° swivel.  
Size: 4-1/2" dia., 7-1/4" ht.  
Overall ht. w/stem 64"; wire 15'.  
Lamp: One medium base lamp,  
100w max.

RUSTIC SEEDED TOPAZ GLASS  
WITH A FORGED BRONZE FINISH.  
ETCHED WHITE GLASS WITH  
BRUSHED NICKEL FINISH.



P4005-09



P4005-77

### THREE-LIGHT CHANDELIER

**P4005-09** Brushed Nickel

**P4005-77** Forged Bronze

Size: 17" dia., 19" ht. Overall ht.  
w/chain 94"; wire 15'.

Lamps: Three candelabra base  
lamps, each 60w max.

*Shown P4006-77 chandelier  
and P3216-77 wall bracket.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Cantata



## WALL BRACKET

**P3216-09** Brushed Nickel

**P3216-77** Forged Bronze

Size: 4-3/4" W., 12-7/8" ht.

Extends 7-1/8". H/CTR 4-1/2".

Lamp: One medium base lamp, 100w max.

## FIVE-LIGHT CHANDELIER

**P4006-09** Brushed Nickel

**P4006-77** Forged Bronze

Size: 23" dia., 22-1/2" ht. Overall

ht. w/chain 98"; wire 15'.

Lamps: Five candelabra base

lamps, each 60w max.



*Close-to-ceiling*

*pg 312*

*Bath & Vanity*

*pg 404*





THE CANTATA COLLECTION IS INSPIRED BY ITS NAME – A SPANISH SONG. THE COMFORTABLE AND SIMPLISTIC DESIGN IS HIGHLIGHTED BY A BRUSHED NICKEL FINISH WITH ETCHED WHITE GLASS SHADES AND SEEDED TOPAZ GLASS WITH FORGED BRONZE FINISH.

#### TWO-LIGHT FOYER

**P3440-09** Brushed Nickel

**P3440-77** Forged Bronze

Chain and ceiling mounts both included.

Size: 15-3/4" dia., 10" ht. Overall ht. w/chain 85"; wire 15'.

Lamps: Two medium base lamps, each 100w max.



#### THREE-LIGHT FOYER PENDANT

**P3814-09** Brushed Nickel

**P3814-77** Forged Bronze

Size: 20" dia., 23-1/2" ht.

Overall ht. w/chain 99"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Cantata



P4039-77



P4039-09

## NINE-LIGHT CHANDELIER

**P4039-09** Brushed Nickel

**P4039-77** Forged Bronze

Two-tier.

Size: 30-3/4" dia., 28" ht. Overall  
ht. w/chain 151"; wire 15'.

Lamps: Nine candelabra base  
lamps, each 60w max.

THE CANTATA COLLECTION IS  
INSPIRED BY ITS NAME – A SPANISH  
SONG. THE COMFORTABLE AND  
SIMPLISTIC DESIGN IS HIGHLIGHTED  
BY A BRUSHED NICKEL FINISH WITH  
ETCHED WHITE GLASS SHADES AND  
SEEDED TOPAZ GLASS IN FORGED  
BRONZE FINISH.

P4040-09

**TWENTY-LIGHT CHANDELIER**

**P4040-09** Brushed Nickel

**P4040-77** Forged Bronze

Three-tier.

Size: 42" dia., 39-5/8" ht. Overall ht.  
w/chain 163"; wire 15'.

Lamps: Twenty candelabra base  
lamps, each 60w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Renovations



## WALL BRACKET

**P3016-77** Forged Bronze

**P3016-81** Antique Nickel

Size: 6" W., 9" ht. Extends 7-7/8",  
H/CTR 4-1/2".

Lamp: One medium base lamp,  
100w max.



P7122-81



P7122-77

## WALL SCONCE

**P7122-77** Forged Bronze

**P7122-81** Antique Nickel

Size: 15-5/8" W., 6-3/4" ht.  
Extends 7-3/4", H/CTR 2-3/4".

Lamp: One medium base  
lamp, 100w max.



P3016-81



P3016-77

*Shown: P4113-77 linear chandelier and  
P7122-77 wall sconce.*



REJUVENATE YOUR AREA WITH CLASSIC DETAILS, CURVED BARS AND CYLINDRICAL ACCENTS. AVAILABLE WITH HANDSOME WHITE DETAILED GLASS IN ANTIQUE NICKEL AND FORGED BRONZE FINISHES.

### THREE-LIGHT FOYER

**P3607-77** Forged Bronze

**P3607-81** Antique Nickel

Chain and ceiling mounts both included.

Size: 15-5/8" dia., 15" ht. Overall ht. w/chain 88"; wire 15'.

Lamps: Three medium base lamps, each 60w max.

### FIVE-LIGHT CHANDELIER

**P4115-77** Forged Bronze

**P4115-81** Antique Nickel

Size: 25" dia., 20" ht. Overall ht. w/chain 95"; wire 15'.

Lamps: Five medium base lamps, each 100w max.



Close-to-ceiling

pg 315



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Renovations



P4116-81



P4113-81



P4116-77

## LINEAR CHANDELIER

**P4113-77** Forged Bronze

**P4113-81** Antique Nickel

Size: 15-5/8" W., 36" L.,  
21-5/8" ht. Overall ht. w/chain  
97"; wire 15'.

Lamps: Two medium base  
lamps, each 100w max.

## SIX-LIGHT CHANDELIER WITH THREE-LIGHT BOWL

**P4116-77** Forged Bronze

**P4116-81** Antique Nickel

Three-light downlight in bowl.

Size: 27-1/4" dia., 27-1/2" ht.  
Overall ht. w/chain 102"; wire 15'.

Lamps: Six medium base lamps,  
each 100w max. and three medium  
base, 60w max., in bowl.



P4113-77



HANDSOME WHITE DETAILED  
GLASS IN ANTIQUE NICKEL AND  
FORGED BRONZE FINISHES.



P4509-77



P5104-77



P5104-81



P4509-81

#### NINE-LIGHT CHANDELIER

**P4509-77** Forged Bronze

**P4509-81** Antique Nickel

Two-tier.

Size: 30" dia., 28-1/8" ht. Overall  
ht. w/chain 151"; wire 15'.

Lamps: Nine medium base  
lamps, each 100w max.

#### MINI-PENDANT

**P5104-77** Forged Bronze

**P5104-81** Antique Nickel

Includes two 12" and two 15"  
stems with 90° swivel.

Size: 6" dia., 6-7/8" ht.

Overall ht. w/stem 63"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Renovations



## THREE-LIGHT FOYER

**P3608-77** Forged Bronze

**P3608-81** Antique Nickel

Size: 17-1/4" dia., 25-3/4" ht.

Glass top diffuser.

Overall ht. w/chain 101";  
wire 15'.

Lamps: Three medium base  
lamps, each 75w max.

## THREE-LIGHT CHANDELIER

**P4114-77** Forged Bronze

**P4114-81** Antique Nickel

Size: 22-1/4" dia., 20-1/4" ht.

Overall ht. w/chain 95"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.





REJUVENATE YOUR AREA WITH CLASSIC DETAILS, CURVED BARS AND CYLINDRICAL ACCENTS. AVAILABLE WITH HANDSOME WHITE DETAILED GLASS, ANTIQUE NICKEL AND FORGED BRONZE FINISHES.



P4510-77

**TWELVE-LIGHT CHANDELIER**

**P4510-77** Forged Bronze

**P4510-81** Antique Nickel

Three-tier.

Size: 33" dia., 39-5/8" ht. Overall  
ht. w/chain 115"; wire 15'.

Lamps: Twelve medium base  
lamps, each 100w max.



P4510-81

*Bath & Vanity*

pg 389



*Fan Light Kit*

pg 366



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Revive

## WALL BRACKET

**P2074-09** Brushed Nickel

**P2074-20** Antique Bronze

One-light.

Size: 4-3/8" W., 9-1/4" ht.

Extends 7-1/2". H/CTR 5-3/8".

Lamp: One medium base lamp, 100w max.

## FOUR-LIGHT FOYER

**P4227-09** Brushed Nickel

**P4227-20** Antique Bronze

Size: 17-1/2" dia., 33-7/8" ht.

Overall ht. w/chain 109";

wire 15'.

Lamps: Four medium base lamps, each 100w max.

## THREE-LIGHT CHANDELIER

**P4234-09** Brushed Nickel

**P4234-20** Antique Bronze

Size: 22" dia., 21-3/4" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



P4234-09



P4227-20



P4227-09



P2074-20



P2074-09



P4234-20

REVIVE OFFERS A FUN TWIST ON TRADITIONAL STYLING. ETCHED FLUTED GLASS COMPLEMENTS ELEGANTLY EXAGGERATED ARM SHAPE.



### THREE-LIGHT INVERTED PENDANT

**P3971-09** Brushed Nickel

**P3971-20** Antique Bronze

Size: 17-3/4" dia., 21-3/4" ht.

Overall ht. w/chain 97"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

### FIVE-LIGHT CHANDELIER

**P4235-09** Brushed Nickel

**P4235-20** Antique Bronze

Size: 22" dia., 21-3/4" ht. Overall ht. w/chain 96"; wire 15'.

Lamps: Five medium base lamps, each 100w max.



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Revive

P4228-09



## FOUR-LIGHT LINEAR CHANDELIER

**P4228-09** Brushed Nickel

**P4228-20** Antique Bronze

Size: 30" L., 4" W., 26-3/4" ht.

Overall ht. w/chain 102"; wire 15'.

Lamps: Four medium base lamps, each 100w max.

P4228-20



Bath & Vanity

pg 388





REVIVE OFFERS A FUN TWIST ON TRADITIONAL STYLING. ETCHED FLUTED GLASS COMPLEMENTS ELEGANTLY EXAGGERATED ARM SHAPE.

#### NINE-LIGHT CHANDELIER

**P4236-09** Brushed Nickel

**P4236-20** Antique Bronze

Two-tier.

Size: 32" dia., 29-1/4" ht. Overall ht. w/chain 104"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

#### MINI-PENDANT \*

**P5148-09** Brushed Nickel

**P5148-20** Antique Bronze

Size: 4" dia., 8" ht. Overall ht. w/stem 76"; wire 10'.

Lamp: One medium base lamp, 100w max.

*\* Includes one 6" stem, four 12" stems and 6 links of chain.*

P4236-20



P4236-09



P5148-09



P5148-20



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Archie



P4689-15  
shown with glass  
facing down



P4689-74  
shown with glass  
facing up

## FIVE-LIGHT CHANDELIER

**P4689-15** Polished Chrome

**P4689-74** Venetian Bronze

Glass can be mounted up or down.  
Size: 26" W., 22" ht. Overall ht.  
w/stem 96"; wire 10'.

Lamps: Five medium base lamps,  
each 100w max.

## PENDANT

**P5026-15** Polished Chrome

**P5026-74** Venetian Bronze

**P5026-81** Antique Nickel

Size: 10-1/2" W., 9-1/4" ht. Overall  
ht. w/stem 75"; wire 10'.

Lamp: One medium base lamp,  
each 100w max.



P5026-15



P5026-74



P5026-81

*Stem-hung pendants include two  
6" stems, two 15" stems and six  
links of chain.*

FINELY CRAFTED STRAP AND KNOB DETAILS WITH DOUBLE PRISMATIC GLASS. THREE AND FIVE LIGHT CHANDELIERS GLASS CAN MOUNT UP OR DOWN.



P4688-74  
shown with glass  
facing up



P4688-15  
shown with glass  
facing down



P5173-15

#### THREE-LIGHT CHANDELIER

**P4688-15** Polished Chrome  
**P4688-74** Venetian Bronze  
Glass can mount up or down.  
Size: 20" W., 16-3/4" ht. Overall  
ht. w/stem 92"; wire 10'.  
Lamps: Three medium base  
lamps, each 100w max.



P5173-81



P5173-74

#### MINI PENDANT


**P5173-15** Polished Chrome  
**P5173-74** Venetian Bronze  
**P5173-81** Anique Nickel  
Size: 5-3/4" W., 8-3/4" ht. Overall ht.  
w/stem 75"; wire 10'.  
Lamp: One medium base lamp,  
each 100w max.

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Archie



Shown: P5026-74 pendant.

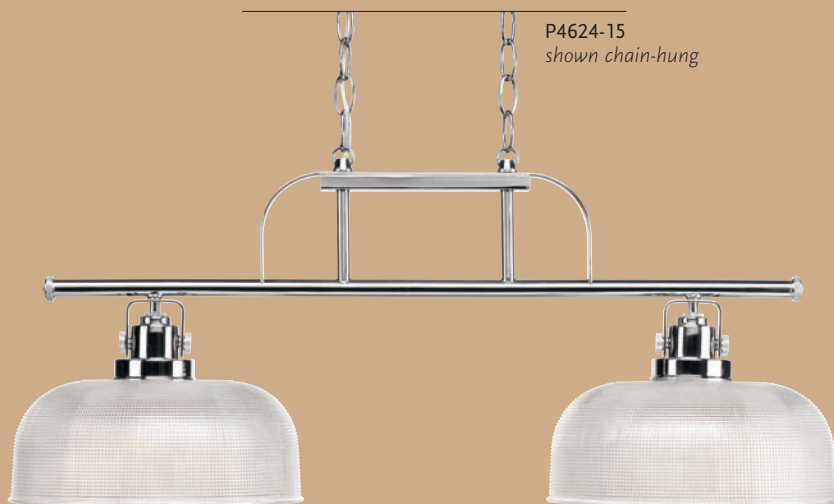

P4624-15  
shown chain-hung



P4624-74  
shown stem-hung

Close to Ceiling  
pg 316





FINELY CRAFTED STRAP AND KNOB DETAILS  
WITH DOUBLE PRISMATIC GLASS.

#### LINEAR CHANDELIER

**P4624-15** Polished Chrome

**P4624-74** Venetian Bronze

Can be stem or chain hung.

Includes two sets of 12" stems and  
6' of chain.

Size: 30" L., 10-5/8" W., 13-1/8" ht.

Overall ht. w/chain 88"; wire 10'.

Lamps: Two medium base lamps,  
each 100w max.

#### NINE-LIGHT CHANDELIER

**P4690-15** Polished Chrome

**P4690-74** Venetian Bronze

Two-tier.

Size: 30" W., 28" ht. Overall ht.

w/stem 102"; wire 10'.

Lamps: Nine medium base  
lamps, each 100w max.



P4690-74



Bath & Vanity

pg 386



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Invite

## WALL BRACKET

**P2041-09** Brushed Nickel

**P2041-20** Antique Bronze

Size: 6-1/2" W., 11-1/2" ht.

Extends 8-1/4". H/CTR 3-3/4".

Lamp: One medium base lamp, 100w max.

## NINE-LIGHT CHANDELIER

**P4697-09** Brushed Nickel

**P4697-20** Antique Bronze

Two-tier. Size: 35-5/8" dia., 26-1/2" ht.

Overall ht. w/stem 92"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

*All hanging fixtures include one 6", four 12" stems and six links of chain.*



Shown: P5110-20 mini pendants and P4696-20 chandelier.

Bath & Vanity

pg 408



Close-to-ceiling

pg 316



HERE IS YOUR INVITATION TO UNDERSTATED ELEGANCE. ICONIC SCROLL ARMS AND DUAL-LAYER ETCHED GLASS AND MYLAR DRUM SHADES. OPTIONAL CLEAR CYLINDRICAL FINIALS OFFER HIGH STYLE.



P4697-20



P2041-20



P2041-09

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

*Invite*



### THREE-LIGHT CHANDELIER

**P4695-09** Brushed Nickel

**P4695-20** Antique Bronze

Etched glass with silk mylar shade.  
Size: 22" dia., 19-3/4" ht. Overall ht.  
w/stem 86"; wire 12'.

Lamps: Three medium base lamps,  
each 100w max.

### FIVE-LIGHT CHANDELIER

**P4696-09** Brushed Nickel

**P4696-20** Antique Bronze

Etched glass with silk mylar shade.  
Size: 25-1/4" dia., 20-3/4" ht.  
Overall ht. w/stem 87"; wire 12'.  
Lamps: Five medium base  
lamps, each 100w max.



P4695-09  
*shown without  
optional finial*





HERE IS YOUR INVITATION TO UNDERSTATED ELEGANCE. INVITE FEATURES ICONIC SCROLL ARMS AND DUAL-LAYER ETCHED GLASS AND MYLAR DRUM SHADES. OPTIONAL CLEAR CYLINDRICAL FINIALS OFFER HIGH STYLE.



P5046-09



P5047-09



P5047-20

#### TWO-LIGHT FOYER PENDANT

**P5046-09** Brushed Nickel

**P5046-20** Antique Bronze

Etched glass with silk mylar shade.

Size: 14" dia., 30-1/4" ht. Overall ht. w/stem 96"; wire 15'.

Lamps: Two medium base T10 lamps, each 60w max.



P5046-20

#### FOUR-LIGHT PENDANT

**P5047-09** Brushed Nickel

**P5047-20** Antique Bronze

Etched glass with silk mylar shade.

Size: 20" dia., 25" ht. Overall ht. w/stem 93"; wire 12'.

Lamps: Four medium base lamps, each 100w max.

#### MINI-PENDANT

**P5110-09** Brushed Nickel

**P5110-20** Antique Bronze

Etched glass with silk mylar shade.

Size: 6-1/2" dia., 7-3/8" ht. Overall ht. w/stem 74"; wire 10'.

Lamp: One medium base lamp, 100w max.



P5110-09



P5110-20

*All hanging fixtures include one 6", four 12" stems and six links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Orbitz



P3030-20

## WALL BRACKET

**P3030-09** Brushed Nickel  
**P3030-20** Antique Bronze  
Size: 5-1/2" W., 7-1/4" ht.  
Extends 6". H/CTR 5".  
Lamp: One medium base  
lamp, 100w max.

## FIVE-LIGHT CHANDELIER

**P4659-20** Antique Bronze  
Size: 23-1/4" dia., 18-1/2" ht.  
Overall ht. w/stem 83"; wire 180".  
Lamps: Five medium base lamps,  
each 100w max.

## SIX-LIGHT CHANDELIER

**P4661-09** Brushed Nickel  
Can be mounted with glass up  
or down.  
Size: 24" dia., 18-3/4" ht. Overall  
ht. w/stem 84"; wire 180"w.  
Lamps: Six medium base lamps,  
each 100w max.



P3030-09

Bath & Vanity  
pg 424





Shown: P4660-20 chandelier and P3058-20 wall sconce.



P4659-20

RECTILINEAR TUBING  
FRAME AND RING  
STYLING. WHITE ETCHED  
GLASS SHADES.



P4661-09  
shown with glass  
mounted up



P4661-09  
shown with glass  
mounted down

All Orbitz stem hung fixtures  
include one 6" stem, four 12"  
stems and 6 links of chain.

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Orbitz



P4660-20  
shown with glass  
facing up



P4662-09  
shown with glass  
facing up

## THREE-LIGHT CONVERTIBLE

**P3954-09** Brushed Nickel

**P3954-20** Antique Bronze

Chain and ceiling mounts  
both included.

Size: 17" dia., 12 1/4" ht. Overall  
ht. w/stem 79"; wire 180".

Lamps: Three medium base  
lamps, each 100w max.



P3954-20

## SIX-LIGHT OVAL CHANDELIER

**P4660-20** Antique Bronze

Size: 32" L., 16-3/4" W., 12" ht. Overall  
ht. w/stem 99"; wire 180".

Lamps: Six medium base lamps, each  
100w max.

## SIX-LIGHT OVAL CHANDELIER

**P4662-09** Brushed Nickel

Can be mounted with glass  
up or down.

Size: 34" L., 16-5/8" W., 13-1/4" ht.  
Overall ht. w/stem 80"; wire 180".

Lamps: Six medium base lamps,  
each 100w max.



P3954-09



ORBITZ IS ACCENTED BY RECTILINEAR TUBING FRAMES AND A CIRCULAR FOCAL POINT. WHITE ETCHED GLASS SHADES COMPLEMENT FIXTURE. BRUSHED NICKEL AND ANTIQUE BRONZE FINISHES.



P4663-20

#### NINE-LIGHT CHANDELIER

**P4663-09** Brushed Nickel

**P4663-20** Antique Bronze

Two-tier.

Size: 27" dia., 23-3/4" ht. Overall ht. w/stem 90"; wire 180".

Lamps: Nine medium base lamps, each 100w max.

#### MINI-PENDANT

**P5114-09** Brushed Nickel

**P5114-20** Antique Bronze

Size: 4" dia., 7-3/4" ht. Overall ht. w/chain or stem 73"; wire 120".

Lamp: One medium base lamp, 100w max.



P4663-09



P5114-09



P5114-20

*All Orbitz stem hung fixtures feature one 6" stem, four 12" stems and 6 links of chain unless otherwise noted.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# CALVEN

## WALL BRACKET

**P3209-09WB** Brushed Nickel  
Includes white glass shade.  
Size: 6-3/8" W., 11-1/2" ht.  
Extends 7-5/8".  
Lamp: One G9 halogen, 60w max., included.

## WALL BRACKET

**P3209-80WB** Forged Black  
Includes both a fabric shade and glass shade for use with bath or as a matching wall sconce. Fabric shade includes an etched glass diffuser.  
Size: 6-3/8" W., 11-1/2" ht.  
Extends 7-5/8".  
Lamp: One G9 halogen, 60w max., included.



**P3209-09WB**  
*Comes with glass shade only*

*Shown with P4539-80 chandelier*

Bath & Vanity  
pg 420



Close-to-ceiling  
pg 317



BOLD, GRAPHIC LINES AND A SCULPTURAL FRAMEWORK FINISHED WITH ARCHITECTURAL DETAILS. OVERSIZED LINEN SHADES IN FORGED BLACK FINISH. ETCHED WHITE GLASS SHADES IN BRUSHED NICKEL FINISH.



**FIVE-LIGHT CHANDELIER**

**P4539-09** Brushed Nickel  
Glass shades.  
Size: 30" dia., 31" ht. Overall ht.  
w/stem 95"; wire 10".  
Lamps: Five candelabra base  
G-16-1/2 lamps, each 60w max.

**FIVE-LIGHT CHANDELIER**

**P4539-80** Forged Black  
Linen shades.  
Size: 30" dia., 23" ht. Overall ht.  
w/stem 89"; wire 10".  
Lamps: Five candelabra base  
G-16-1/2 lamps, each 60w max.

*Includes two 6", one 12",  
two 15" stems and six links of chain.*



**P3209-80WB**  
*shown with included  
glass shade*



**P3209-80WB**  
*shown with included  
fabric shade*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# CALVEN



THREE-LIGHT FOYER

**P3878-09** Brushed Nickel  
Glass shade.  
Stem and ceiling mounts both included.  
Size: 16" dia., 10-1/4" ht. Overall  
ht. w/stem 75"; wire 10'.  
Lamps: Three medium base  
lamps, each 100w max.

THREE-LIGHT FOYER

**P3878-80** Forged Black  
Linen shade with etched glass  
diffuser on bottom.  
Stem and ceiling mounts both  
included.  
Size: 15" dia., 10-1/4" ht. Overall  
ht. w/stem 76"; wire 10'.  
Lamps: Three medium base  
lamps, each 100w max.


MINI-PENDANT

**P5118-09WB** Brushed Nickel  
Glass shade.  
Size: 6-3/8" dia., 10-3/4" ht.  
Overall ht. w/stem 75"; wire 120".  
Lamp: One G9 base halogen  
lamp, 60w max., included.

MINI-PENDANT

**P5118-80WB** Forged Black  
Linen shade with etched glass  
diffuser on bottom.  
Size: 6-3/8" dia., 10-5/8" ht.  
Overall ht. w/stem 77"; wire 10'.  
Lamp: One G9 base halogen  
lamp, 60w max.

*Includes two 6", one 12",  
two 15" stems and six links of chain.*

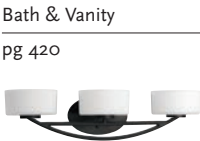

Bath & Vanity  
pg 420



Close-to-ceiling  
pg 317



BOLD, GRAPHIC LINES AND A SCULPTURAL FRAMEWORK FINISHED WITH ARCHITECTURAL DETAILS. LINEN SHADES IN FORGED BLACK FINISH. ETCHED WHITE GLASS SHADES IN BRUSHED NICKEL FINISH.



#### THREE-LIGHT CHANDELIER

##### **P4537-09** Brushed Nickel

Glass shades.

Size: 25" dia., 26" ht. Overall ht. w/stem 90"; wire 10'.

Lamps: Three candelabra base G-16-1/2 lamps, each 60w max.

#### THREE-LIGHT CHANDELIER

##### **P4537-80** Forged Black

Linen shades with etched glass diffusers.

Size: 25" dia., 20" ht. Overall ht. w/stem 86"; wire 10'.

Lamps: Three candelabra base G-16-1/2 lamps, each 60w max.

*Includes two 6", one 12", two 15" stems and six links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Wisten



## FIVE-LIGHT CHANDELIER

**P4436-09** Brushed Nickel

**P4436-20** Antique Bronze

Size: 22" dia., 26-3/8" ht. Overall  
ht. w/chain 101"; wire 15'.

Lamps: Five candelabra base  
lamps, each 60w max.

## NINE-LIGHT CHANDELIER

**P4439-09** Brushed Nickel

**P4439-20** Antique Bronze

Two-tier.

Size: 27" dia., 33-3/8" ht.

Overall ht. w/chain 156";  
wire 15'.

Lamps: Nine candelabra base  
lamps, each 60w max.



Close-to-ceiling

pg 319



[progresslighting.com](http://progresslighting.com)



*Shown: P4439-09 chandelier  
and P3510-09 foyer.*

WISTEN FEATURES ETCHED  
ELONGATED GLASS IN A VARIETY  
OF ETCHED SIZES EXEMPLIFYING  
MODERN DESIGN.



P4436-09



P4436-20



P4439-20

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Wisten

## MINI-PENDANT

**P5108-09** Brushed Nickel

**P5108-20** Antique Bronze

Includes two 6", one 12" and two 15" stems with 90° swivel.

Size: 4" dia., 6-3/4" ht. Overall ht. w/stem 120"; wire 15'.

Lamp: One medium base lamp, 100w max.

## CFL MINI-PENDANT

**P5108-09EBWB** Brushed Nickel

**P5108-20EBWB** Antique Bronze

Includes two 6", one 12" and two 15" stems with 90° swivel.

Size: 4" dia., 6-3/4" ht. Overall ht. w/stem 120"; wire 15'.

Lamp: One 13w GU24 CFL lamp, included.



P5108-20  
P5108-20EBWB

P5108-09  
P5108-09EBWB



## PENDANT

**P5112-09** Brushed Nickel

**P5112-20** Antique Bronze

One-light.

Size: 17" dia., 21-1/8" ht.

Overall ht. w/chain 96"; wire 15'.

Lamp: One medium base lamp, 100w max.

## MINI-PENDANT

**P5167-09** Brushed Nickel

**P5167-20** Antique Bronze

Includes two 6", one 12" and two 15" stems with 90° swivel.

Size: 3-3/4" dia., 9-3/4" ht.

Overall ht. w/stem 67"; wire 10'.

Lamp: One medium base lamp, 100w max.

Socket tool included.

Bath & Vanity

pg 423





REFRESH YOUR DECOR WITH A LESS COMPLICATED, CLEAN DESIGN. WISTEN IS A SIMPLE, MODERN AND BALANCED COLLECTION, FEATURING ETCHED GLASS, BRUSHED NICKEL AND ANTIQUE BRONZE FINISHES. PERFECT FOR TODAY'S UNDERSTATED INTERIORS.



**THREE-LIGHT FOYER**  
**P3509-09** Brushed Nickel  
**P3509-20** Antique Bronze  
 Size: 12" dia., 26" ht. Overall ht. w/chain 101"; wire 15'.  
 Lamps: Three candelabra base lamps, each 60w max.

**FIVE-LIGHT FOYER**  
**P3510-09** Brushed Nickel  
**P3510-20** Antique Bronze  
 Size: 16" dia., 43" ht. Overall ht. w/chain 118"; wire 15'.  
 Lamps: Five candelabra base lamps, each 60w max.

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

Fan Light Kit  
 pg 365



# Wisten

## WALL BRACKET

**P2794-09** Brushed Nickel

**P2794-20** Antique Bronze

One-light.

Size: 4-1/2" W., 8-1/4" ht.

Extends 6-1/4". H/CTR 4".

Lamp: One medium base lamp, 100w max.

## CFL WALL BRACKET

**P2794-09WB** Brushed Nickel

**P2794-20WB** Antique Bronze

One-light.

Size: 4-1/2" W., 8-1/4" ht.

Extends 6-1/4". H/CTR 4".

Lamp: One 13w GU24 CFL lamp, included.



## LINEAR CHANDELIER

**P4435-09** Brushed Nickel

**P4435-20** Antique Bronze

Four-light. Includes two 6", one 12" and two 15" stems with 90° swivel.

Size: 35" L., 12-1/2" W., 29" ht.

Overall ht. w/stem 79"; wire 15'.

Lamps: Four candelabra base lamps, each 60w max



P2794-20  
P2794-20WB



P2794-09  
P2794-09WB

REFRESH YOUR DECOR WITH A LESS COMPLICATED, CLEAN DESIGN. WISTEN IS A SIMPLE, MODERN AND BALANCED COLLECTION, FEATURING ETCHED GLASS, BRUSHED NICKEL AND ANTIQUE BRONZE FINISHES. PERFECT FOR TODAY'S UNDERSTATED INTERIORS.

#### THREE-LIGHT FOYER

**P3757-09** Brushed Nickel

**P3757-20** Antique Bronze

Size: 18-1/8" dia., 25" ht.

Overall ht. w/chain 100";

wire 15'.

Lamps: Three medium base lamps, each 100w max.

#### THREE-LIGHT CFL FOYER

**P3757-09EBWB** Brushed Nickel

**P3757-20EBWB** Antique Bronze

Size: 18-1/8" dia., 25" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Three 13w GU24 CFL lamps, included.



#### THREE-LIGHT CHANDELIER

**P4434-09** Brushed Nickel

**P4434-20** Antique Bronze

Size: 13" dia., 20-1/2" ht. Overall

ht. w/chain 95"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



P4434-09



P4434-20

P3757-09  
P3757-09EBWB



P3757-20  
P3757-20EBWB



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Rave



## MINI-PENDANT

**P5128-09WB** Brushed Nickel  
Size: 7" dia., 10-3/4" ht. Overall ht.  
w/chain or stem 76"; wire 120".  
Lamp: One candelabra base krypton  
lamp, 60w max. included.



Shown: P4643-09 chandelier.



RAVE'S OVAL TUBING FRAME IS ACCENTED BY SWEEPING STRAPS, SOFTLY ARCHING CURVES AND OPAL ETCHED GLASS SHADES.

THREE-LIGHT INVERTED PENDANT

**P3944-09** Brushed Nickel  
Size: 19" dia., 23-1/2" ht. Overall  
ht. w/chain 89"; wire 180".  
Lamps: Three medium base  
lamps, each 100w max.

THREE-LIGHT CHANDELIER

**P4641-09** Brushed Nickel  
Size: 20" dia., 17-3/8" ht. Overall  
ht. w/chain 80"; wire 180".  
Lamps: Three G16-1/2  
candelabra base lamps, each  
60w max.

FIVE-LIGHT CHANDELIER

**P4642-09** Brushed Nickel  
Size: 24-1/2" dia., 20-3/4" ht.  
Overall ht. w/chain 84";  
wire 180".  
Lamps: Five G16-1/2 candelabra  
base lamps, each 60w max.

NINE-LIGHT CHANDELIER

**P4643-09** Brushed Nickel  
Two-tier.  
Size: 27" dia., 27-1/4" ht. Overall  
ht. w/chain 87"; wire 180".  
Lamps: Nine G16-1/2 candelabra  
base lamps, each 60w max.

*All Rave hanging fixtures include  
one 6 stem", four 12" stems and  
6 links of chain.*

Close-to-ceiling

pg 319



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

Alexa



FOUR-LIGHT FOYER

**P3977-09** Brushed Nickel  
Size: 18" W., 44-3/8" ht. Overall  
ht. w/chain 119"; wire 15'.  
Lamps: Four medium base  
lamps, each 100w max.



*Shown: P4459-09 chandelier.*

ALEXA FEATURES A PLEASING SIMPLE  
BRUSHED METAL FRAME. WHITE LINEN  
GLASS WITH A CRISP CLEAR EDGE  
ACCENT CREATES A SOPHISTICATED  
MODERN LOOK.



#### WALL BRACKET

**P2959-09** Brushed Nickel  
One-light. Mounts up or down.  
Size: 4-1/2" W., 9-1/4" ht.  
Extends 6-1/8".  
Lamp: One medium base  
lamp, 100w max.

#### THREE-LIGHT CHANDELIER

**P4458-09** Brushed Nickel  
Size: 17" dia., 19-5/8" ht.  
Overall ht. w/chain 95"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

#### FIVE-LIGHT CHANDELIER

**P4459-09** Brushed Nickel  
Size: 20" dia., 19-7/8" ht.  
Overall ht. w/chain 95"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

#### MINI-PENDANT

**P5147-09** Brushed Nickel  
Includes two 6", one 12" and  
two 15" stems with 90° swivel.  
Size: 4" dia., 7-5/8" ht.  
Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



P2959-09



P4458-09



P5147-09

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

Alexa



THREE-LIGHT FOYER

**P3846-09** Brushed Nickel

Size: 18" dia., 24-3/8" ht.

Overall ht. w/chain 99"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

NINE-LIGHT CHANDELIER

**P4626-09** Brushed Nickel

Two-tier.

Size: 28" dia., 28-1/2" ht. Overall  
ht. w/chain 102"; wire 15'.

Lamps: Nine medium base  
lamps, each 60w max.



Bath & Vanity  
pg 422



Close-to-ceiling  
pg 320





ALEXA FEATURES A PLEASING SIMPLE BRUSHED METAL FRAME. WHITE LINEN GLASS WITH A CRISPER CLEAR EDGE ACCENT CREATES A SOPHISTICATED MODERN LOOK..

FOUR-LIGHT LINEAR CHANDELIER

**P4619-09** Brushed Nickel  
Size: 34" L., 4-1/2" W., 20" ht.  
Overall ht. w/chain 93"; wire 15'.  
Lamps: Four medium base lamps, each 60w max.



*Shown: P5147-09 mini-pendants.*



P4619-09

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# JOY

WITH SOPHISTICATED DESIGN STYLING, JOY FEATURES VOLUMINOUS CURVES FOR A SOFT AND STYLISH PROFILE. ETCHED LIGHT UMBER GLASS SHADES IN AN ANTIQUE BRONZE FINISH OR ETCHED WHITE GLASS SHADES WITH A BRUSHED NICKEL FINISH COMPLEMENT THE FASHION-FORWARD FRAME.



P4490-09  
*shown chain hung*



P4490-20  
*shown stem hung*



P4490-20  
*shown chain hung*





#### FIVE-LIGHT CHANDELIER

**P4490-09** Brushed Nickel

**P4490-20** Antique Bronze

Chain- or stem-hung chandelier.

Size: 24" dia., 18-7/8" ht. Overall  
ht. w/chain or stem 105"; wire 12'.

Lamps: Five medium base lamps,  
each 100w max.

*All Joy fixtures come with two  
6" stems and 72" of chain.*

*Shown: P4490-09 chandelier and  
P2000-09 wall brackets.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# JOY



P4492-09  
shown chain hung



P4492-20  
shown stem hung



P4497-09

## NINE-LIGHT CHANDELIER

**P4492-09** Brushed Nickel

**P4492-20** Antique Bronze

Two-tier. Chain- or stem-hung chandelier.

Size: 28" dia., 27-3/4" ht. Overall ht. w/chain or stem 115"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

Bath & Vanity  
pg 436





WITH SOPHISTICATED DESIGN STYLING, JOY FEATURES VOLUMINOUS CURVES FOR A SOFT AND STYLISH PROFILE. ETCHED LIGHT UMBER GLASS SHADES IN AN ANTIQUE BRONZE FINISH OR ETCHED WHITE GLASS SHADES WITH A BRUSHED NICKEL FINISH COMPLEMENT THE FASHION-FORWARD FRAME.

#### TWELVE-LIGHT CHANDELIER

**P4497-09** Brushed Nickel

**P4497-20** Antique Bronze

Three-tier.

Size: 38" w., 38-5/8" ht.

Overall ht. w/chain 175"; wire 15'.

Lamps: Twelve medium base

lamps, each 75w max.

#### TWO-LIGHT LINEAR CHANDELIER \*

**P4014-09** Brushed Nickel

**P4014-20ETUM** Antique Bronze

w/etched umber glass

**P4014-20EUL** Antique Bronze w/

etched umber linen shades

Size: 36" L., 15" W., 21-1/2" ht.

Overall ht. w/stem 88"; wire 15'.

Lamps: Two medium base lamps,

each 100w max.

\* Includes two 6" stems, eight 12" stems and two sets of 6 links of chain.



P4497-20



P4014-09

P4014-20ETUM

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# JOY

WITH SOPHISTICATED DESIGN STYLING, JOY FEATURES VOLUMINOUS CURVES FOR A SOFT AND STYLISH PROFILE. ETCHED LIGHT UMBER GLASS SHADES IN AN ANTIQUE BRONZE FINISH OR ETCHED WHITE GLASS SHADES WITH A BRUSHED NICKEL FINISH COMPLEMENT THE FASHION-FORWARD FRAME.



### THREE-LIGHT PENDANT

**P3951-09** Brushed Nickel  
**P3951-20** Antique Bronze  
Size: 19-1/2" dia., 24-3/4" ht.,  
Overall ht. w/stem 114"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

### MINI-PENDANT

**P5270-09** Brushed Nickel  
**P5270-20** Antique Bronze  
Chain- or stem-hung  
mini-pendant.  
Size: 6" dia., 7" ht. Overall ht.  
w/chain or stem 94"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.



Fan Light Kit  
pg 365





P3587-20  
shown chain hung



P4489-20  
shown stem hung



P3587-09  
shown stem hung



P4489-09  
shown chain hung



P5193-20ETUM



P5193-09

### THREE-LIGHT FOYER

**P3587-09** Brushed Nickel  
**P3587-20** Antique Bronze  
 Chain- or stem-hung foyer.  
 Size: 14-5/8" dia., 17" ht. Overall  
 ht. w/chain or stem 104"; wire 12'.  
 Lamps: Three candelabra base  
 lamps, each 60w max.

### ONE-LIGHT PENDANT

**P5193-09** Brushed Nickel  
**P5193-20ETUM** Antique Bronze  
 with etched amber glass  
 Size: 19-1/2" dia. 8-5/8" ht.  
 Overall ht. w/chain 95"; wire 10".  
 Lamp: One medium base lamp,  
 100w max.

### THREE-LIGHT CHANDELIER

**P4489-09** Brushed Nickel  
**P4489-20** Antique Bronze  
 Chain- or stem-hung chandelier.  
 Size: 20" dia., 16-3/8" ht. Overall  
 ht. w/chain or stem 103"; wire 12'.  
 Lamps: Three medium base  
 lamps, each 100w max.

Bath & Vanity  
 pg 436



See pages 298-301 for accessories,  
 including additional chain and  
 stems, stem kits, shades and more.

Bravo



P3912-09  
P3912-09WB



P4622-09



Fan Light Kit  
pg 365

Bath & Vanity  
pg 444





A CURRENT, TRULY TRANSITIONAL STYLE IS ACHIEVED WITH BRAVO'S FREE-FLOWING ARMS THAT ARE GRACEFULLY SUSPENDED WITH FLUTED SHAPED GLASS SHADES. ANTIQUE BRONZE FINISH WITH ETCHED UMBER LINEN PATTERN GLASS SHADES OR WHITE ETCHED GLASS SHADES WITH A BRUSHED NICKEL FINISH.



Shown: P4625-20 chandelier

#### THREE-LIGHT FOYER

**P3912-09** Brushed Nickel

**P3912-20** Antique Bronze

Size: 21" dia., 23-1/2" ht. Overall ht. w/chain 98"; wire 12'.

Lamps: Three medium base lamps, each 100w max.

#### THREE-LIGHT CFL FOYER

**P3912-09WB** Brushed Nickel

Size: 21" dia., 23-1/2" ht. Overall ht. w/chain 98"; wire 180".

Lamps: Three 13w GU24 CFL lamps included.



#### FOUR-LIGHT CHANDELIER

**P4622-09** Brushed Nickel

**P4622-20** Antique Bronze

Size: 24" dia., 21" ht. Overall ht. w/chain 96"; wire 12'.

Lamps: Four medium base lamps, each 100w max.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Bravo

## NINE-LIGHT CHANDELIER

**P4625-09** Brushed Nickel

**P4625-20** Antique Bronze

Two-tier.

Size: 32" dia., 31" ht. Overall ht. w/chain 106"; wire 12'.

Lamps: Nine medium base lamps, each 100w max.

## TWELVE-LIGHT CHANDELIER

**P4687-09** Brushed Nickel

**P4687-20** Antique Bronze

Three-tier.

Size: 38" W., 44" ht. Overall ht. w/chain 119"; wire 15'.

Lamps: Twelve medium base lamps, each 100w max.



P3969-09



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

## CHANDELIER, FOYER AND PENDANTS

P4687-09

A CURRENT, TRULY TRANSITIONAL STYLE IS ACHIEVED WITH BRAVO'S FREE-FLOWING ARMS THAT ARE GRACEFULLY SUSPENDED WITH FLUTED SHAPED GLASS SHADES. ANTIQUE BRONZE FINISH WITH ETCHED UMBER LINEN GLASS SHADES OR WHITE ETCHED GLASS SHADES WITH A BRUSHED NICKEL FINISH.



P4621-09  
P4621-09WB



P3969-20



P4621-20




**THREE-LIGHT FOYER**  
**P3969-09** Brushed Nickel  
**P3969-20** Antique Bronze  
Size: 20" dia., 30-3/8" ht., Overall  
ht. w/chain 102"; wire 15'.  
Lamps: Three medium base lamps,  
each 100w max.

**THREE-LIGHT CHANDELIER**  
**P4621-09** Brushed Nickel  
**P4621-20** Antique Bronze  
Size: 23" dia., 20-1/8" ht. Overall  
ht. w/chain 95"; wire 12'.  
Lamps: Three medium base  
lamps, each 100w max.

**THREE-LIGHT CFL  
CHANDELIER**  
**P4621-09WB** Brushed Nickel  
Size: 23" dia., 20-1/8" ht. Overall  
ht. w/chain 95"; wire 12'.  
Lamps: Three 13W GU24 CFL  
lamps included.



Bravo

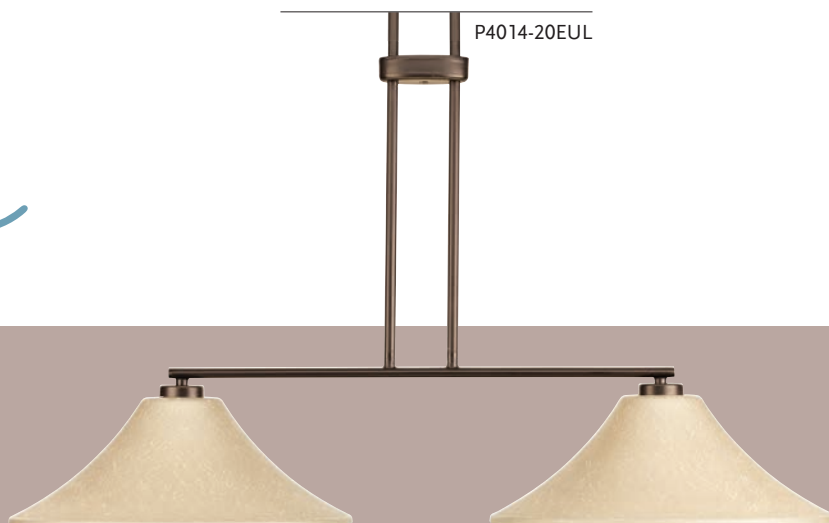

P4014-20EUL

P4014-09

TWO-LIGHT LINEAR  
CHANDELIER \*

**P4014-09** Brushed Nickel

**P4014-20EUL** Antique Bronze  
w/etched amber glass

Size: 36" L., 15" W., 21-1/2" ht.

Overall ht. w/stem 88"; wire 15'.

Lamps: Two medium base lamps,  
each 100w max.

MINI-PENDANT\*\*

**P5300-09** Brushed Nickel

**P5300-20** Antique Bronze

Chain- or stem-hung.

Size: 7-1/4" dia., 6-1/2" ht.

Overall ht. w/chain or stem 94";  
wire 10'.

Lamp: One medium base lamp,  
100w max.

CFL MINI-PENDANT\*\*

**P5300-09WB** Brushed Nickel

Chain- or stem-hung.

Size: 7-1/4" dia., 6-1/2" ht.

Overall ht. w/chain or stem 94";  
wire 10'.

Lamp: One 13w GU24 CFL lamp  
included.



P5300-20



P5300-09  
P5300-09WB



\* Includes two 6" stems, eight 12"  
stems and two sets of 6 links of  
chain.

\*\* Includes 6' of chain and two 6"  
stems.





A CURRENT, TRULY TRANSITIONAL STYLE IS ACHIEVED WITH BRAVO'S FREE-FLOWING ARMS THAT ARE GRACEFULLY SUSPENDED WITH FLUTED SHAPED GLASS SHADES. ANTIQUE BRONZE FINISH WITH ETCHED UMBER LINEN SHADES OR WHITE ETCHED GLASS SHADES WITH A BRUSHED NICKEL FINISH.



P3821-20



P4623-20

**FIVE-LIGHT CHANDELIER**

**P4623-09** Brushed Nickel  
**P4623-20** Antique Bronze  
 Size: 27" dia., 23" ht. Overall ht. w/chain 97"; wire 12'.  
 Lamps: Five medium base lamps, each 100w max.

**FIVE-LIGHT CFL CHANDELIER**

**P4623-09WB** Brushed Nickel  
 Size: 27" dia., 23" ht. Overall ht. w/chain 97"; wire 12'.  
 Lamps: Five 13w GU24 CFL lamps included.



P3821-09

**THREE-LIGHT CHANDELIER**

**P3821-09** Brushed Nickel  
**P3821-20** Antique Bronze  
 Size: 18" dia., 21-1/2" ht. Overall ht. w/chain 96"; wire 12'.  
 Lamps: Three candelabra base lamps, each 60w max.

**ONE-LIGHT PENDANT**

**P5193-09** Brushed Nickel  
**P5193-20EUL** Antique Bronze with etched umber linen glass  
 Size: 19-1/2" dia. 8-5/8" ht. Overall ht. w/chain 95"; wire 10".  
 Lamp: One medium base lamp, 100w max.



P5193-09



P5193-20EUL



P4623-09  
 P4623-09WB

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Replay



WALL BRACKET  
**P2131-31** Black  
**P2131-104** Polished Nickel  
Size: 5" W., 9-3/4" ht.  
Extends 5-7/8". H/CTR  
5-7/8".  
Lamp: One medium base  
lamp, 100w max.



**P4319-104**  
*shown down*



**P4319-104**  
*shown up*



**P2131-31**



**P2131-104**

SMOOTH FORMS, LINEAR DETAILS AND A PLEASINGLY ELEGANT FRAME ENHANCE A SIMPLIFIED MODERN LOOK WITHIN THE REPLAY COLLECTION. INDIVIDUALS ARE ABLE TO CREATE A COMPLETELY DIFFERENT LOOK FOR INTERIOR SPACES BY CHOOSING FROM AMONG EITHER THE POLISHED NICKEL OR BLACK FINISH OPTIONS.



P4319-31  
shown down



P4319-31  
shown up

#### FIVE-LIGHT CHANDELIER

**P4319-31** Black

**P4319-104** Polished Nickel

Size: 21" dia., 19-5/8" ht. Overall

ht. w/chain 95"; wire 180".

Lamps: Three medium base

lamps, each 100w max.

#### MINI-PENDANT

**P5170-31** Black

**P5170-104** Polished Nickel

Size: 4" dia., 6" ht.

Overall ht. w/stem 72";

wire 120".

Lamp: One medium base

lamp, 100w max.

*All hanging fixtures include one 6 stem", four 12" stems and 6 links of chain.*



P5170-104

P5170-31

Close-to-ceiling

pg 320



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Replay



## TWO-LIGHT SEMI-FLUSH

**P3424-31** Black

**P3424-104** Polished Nickel

Size: 14-3/4" dia., 10" ht. Overall  
ht. w/chain 50"; wire 10'.

Lamps: Two medium base lamps,  
each 100w max.

## THREE-LIGHT INVERTED PENDANT

**P3450-31** Black

**P3450-104** Polished Nickel

Size: 16-5/8" dia., 19" ht. Overall  
ht. w/stem 92-1/2"; wire 180".

Lamps: Three medium base  
lamps, each 100w max.





SMOOTH FORMS, LINEAR DETAILS AND A PLEASINGLY ELEGANT FRAME ENHANCE A SIMPLIFIED MODERN LOOK WITHIN THE REPLAY COLLECTION. INDIVIDUALS ARE ABLE TO CREATE A COMPLETELY DIFFERENT LOOK FOR INTERIOR SPACES BY CHOOSING FROM AMONG EITHER THE POLISHED NICKEL OR BLACK FINISH OPTIONS.



P4318-104  
shown down



P4318-31  
shown down

### THREE-LIGHT CHANDELIER

**P4318-31** Black

**P4318-104** Polished Nickel

Size: 17" dia., 19-5/8" ht. Overall ht. w/stem 95"; wire 180".

Lamps: Three medium base lamps, each 100w max.

### PENDANT

**P5162-31** Black

**P5162-104** Polished Nickel

Size: 14-3/8" dia., 6-1/8" ht. Overall ht. w/stem 72";

wire 15'.

Lamp: One medium base lamp, 100w max.



P4318-31  
shown up



P5162-104



P5162-31

*All hanging fixtures include one 6 stem", four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# North Park



TWELVE-LIGHT CHANDELIER

**P4053-09** Brushed Nickel

**P4053-74** Venetian Bronze

Two-tier.

Size: 27-1/4" W., 30-1/8" ht. Overall

ht. w/chain 154"; wire 15'.

Lamps: Twelve medium base

lamps, each 100w max.



P4053-74



P4053-09

*Shown: P4004-20 chandelier.*

REDISCOVER HANDSOME HARDWARE STYLES  
WITH MODERN AND CLASSIC LOOKS. TWIN  
ARCHING ARMS AND SQUARE ETCHED GLASS  
SHADES IN AN UPDATED MISSION STYLE.

#### FOUR-LIGHT CHANDELIER

**P4002-09** Brushed Nickel

**P4002-74** Venetian Bronze

Size: 21" W., 22-3/4" ht. Overall  
ht. w/chain 98"; wire 15'.

Lamps: Four medium base  
lamps, each 100w max.

#### EIGHT-LIGHT CHANDELIER

**P4004-09** Brushed Nickel

**P4004-74** Venetian Bronze

Size: 27-1/4" W., 24-5/8" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Eight medium base lamps,  
each 100w max.

P4002-09

P4004-74

P4004-09



Fan Light Kit

pg 365



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# North Park



## FOUR-LIGHT CHANDELIER

**P4001-09** Brushed Nickel

**P4001-74** Venetian Bronze

Size: 21" W., 19-5/8" ht.

Overall ht. w/chain 95";

wire 15'.

Lamps: Four medium base lamps, each 100w max.

## LINEAR CHANDELIER

**P4003-09** Brushed Nickel

**P4003-74** Venetian Bronze

Six-light.

Size: 27-1/4" L., 14-1/4" W.,

22-5/8" ht. Overall ht.

w/chain 98"; wire 15'.

Lamps: Six medium base lamps, each 100w max.



Bath & Vanity

pg 432





REDISCOVER HANDSOME HARDWARE STYLES. NORTH PARK IS TRANSITIONAL WITH MODERN AND CLASSIC LOOKS.

#### TWO-LIGHT FOYER

**P3597-09** Brushed Nickel

**P3597-74** Venetian Bronze

Chain and ceiling mounts both included.

Size: 12-3/4" sq., 13-5/8" ht.

Overall ht. w/chain 89"; wire 15'.

Lamps: Two medium base lamps, each 100w max.

#### TWO-LIGHT INVERTED PENDANT

**P3906-09** Brushed Nickel

**P3906-74** Venetian Bronze

Size: 16" sq., 24-1/8" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Two medium base lamps, each 100w max.

#### MINI-PENDANT

**P5135-09** Brushed Nickel

**P5135-74** Venetian Bronze

Includes two 6", one 12" and two 15" stems with 90° swivel.

Size: 5-1/2" dia., 7-1/8" ht.

Overall ht. w/stem 64-1/8"; wire 15'.

Lamp: One medium base lamp, 100w max.

Close-to-ceiling

pg 322



P3906-09



P3597-09



P5135-74



P5135-09



P3597-74

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Glendale



P3781-09

P4085-09

## THREE-LIGHT FOYER

**P3781-09** Brushed Nickel

Size: 19" dia., 26-1/2" ht.

Overall ht. w/chain 102";  
wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

## NINE-LIGHT CHANDELIER

**P4085-09** Brushed Nickel

Two-tier.

Size: 29" dia., 30-3/4" ht.

Overall ht. w/chain 154";  
wire 15'.

Lamps: Nine medium base  
lamps, each 100w max.



Close-to-ceiling

pg 322



ALABASTER GLASS WITH ROUND TUBULAR  
ARMS IN BRUSHED NICKEL FINISH.

THREE-LIGHT CHANDELIER

**P4082-09** Brushed Nickel  
Size: 23-1/2" dia., 24-3/4" ht.  
Overall ht. w/chain 100";  
wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

FIVE-LIGHT CHANDELIER

**P4083-09** Brushed Nickel  
Size: 26" dia., 28" ht.  
Overall ht. w/chain 103";  
wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

THREE-LIGHT CHANDELIER

**P4086-09** Brushed Nickel  
Size: 20-1/2" dia., 20-1/2" ht.  
Overall ht. w/chain 95"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

P4086-09



P4083-09



P4082-09



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Pavilion

## WALL BRACKET

**P3265-09** Brushed Nickel  
**P3265-20** Antique Bronze  
Size: 8-3/4" W., 9-1/4" ht.  
Extends 10-1/8".  
Lamp: One medium base  
lamp, 100w max.

## PENDANT

**P5084-09** Brushed Nickel  
**P5084-20** Antique Bronze  
Size: 20-1/4" dia., 10-5/8"  
ht. Overall ht. w/chain 86";  
wire 15'.  
Lamp: One medium base  
lamp, 150w max.



P3265-20



P3265-09



P5084-09



P5084-20

*Shown: P3265-20 wall  
bracket and P4603-20  
chandelier*



REFRESH WITH CASUAL, ETCHED WATERMARK GLASS. PAVILION IS A ROMANTIC COLLECTION THAT HAS A COMFORTABLE FEEL.

### THREE-LIGHT FOYER

**P3325-09** Brushed Nickel

**P3325-20** Antique Bronze

Glass top diffuser.

Size: 22-1/8" dia., 29-1/2" ht.

Overall ht. w/chain 105"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

### THREE-LIGHT CHANDELIER

**P4579-09** Brushed Nickel

**P4579-20** Antique Bronze

Size: 23-7/8" dia., 18-3/8" ht.

Overall ht. w/chain 94";

wire 15'.

Lamps: Three medium base lamps, each 100w max.

### THREE-LIGHT CHANDELIER

**P4580-09** Brushed Nickel

**P4580-20** Antique Bronze

Size: 23-7/8" dia., 20-7/8" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



P4579-09



P4579-20



P4580-09



P3325-20



P3325-09



P4580-20

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Pavilion



## TWELVE-LIGHT FOYER

**P4604-09** Brushed Nickel

**P4604-20** Antique Bronze

Three-tier.

Size: 34-3/4" dia., 46-1/2" ht. Overall ht. w/chain 170"; wire 15'.

Lamps: Twelve medium base lamps, each 100w max.

## MINI-PENDANT

**P5125-09** Brushed Nickel

**P5125-20** Antique Bronze

Includes two 12" and two 15" stems with 90° swivel.

Size: 9-7/8" dia., 6-1/4" ht. Overall ht. w/stem 63"; wire 10'.

Lamp: One medium base lamp, 100w max.



Close-to-ceiling

pg 321



REFRESH WITH CASUAL, ETCHED  
WATERMARK GLASS AND  
TWISTED ROPE DETAILING.

#### FOUR-LIGHT CHANDELIER

**P4592-09** Brushed Nickel

**P4592-20** Antique Bronze

Size: 27-7/8" dia., 22-3/8" ht. Overall  
ht. w/chain 98"; wire 15'.

Lamps: Four medium base lamps,  
each 100w max.

#### NINE-LIGHT CHANDELIER

**P4603-09** Brushed Nickel

**P4603-20** Antique Bronze

Two-tier.

Size: 32-5/8" dia., 32-3/8" ht.

Overall ht. w/chain 156"; wire 15'.

Lamps: Nine medium base lamps,  
each 100w max.



Bath & Vanity

Pg 433



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Spirit



P4605-20



P3455-144



## THREE-LIGHT INVERTED PENDANT

**P3455-20** Antique Bronze

**P3455-144** Pebbles

Size: 18" dia., 24-3/4" ht. Overall  
ht. w/stem 91"; wire 12'.

Lamps: Three medium base  
lamps, each 100w max.

## FIVE-LIGHT CHANDELIER

**P4605-20** Antique Bronze

**P4605-144** Pebbles

Size: 25-1/2" dia., 25-1/8" ht.  
Overall ht. w/stem 91"; wire 15'.

Lamps: Five medium base  
lamps, each 100w max.

*Includes one 6" stem, four 12"  
stems and 6 links of chain.*

Bath & Vanity

pg 439





THE SPIRIT OF CRAFTSMANSHIP PREVAILS WITH SUBTLE FORMS. LIGHT UMBER ETCHED GLASS SHADES. PEBBLES FINISH OFFERS A GALVANIZED METAL LOOK OR ANTIQUE BRONZE FINISH.



#### NINE-LIGHT CHANDELIER

**P4611-20** Antique Bronze

**P4611-144** Pebbles

Two-tier.

Size: 32-1/4" dia., 35" ht. Overall ht. w/stem 101"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

Close-to-ceiling

pg 323



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Spirit

## THREE-LIGHT CHANDELIER

**P4559-20** Antique Bronze

**P4559-144** Pebbles

Size: 26-1/2" dia., 18-3/8" ht.

Overall ht. w/stem 84"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## MINI-PENDANT

**P5160-20** Antique Bronze

**P5160-144** Pebbles

Size: 7-1/8" dia., 6-3/4" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp, 100w max.

*Includes one 6" stem, four 12" stems and 6 links of chain.*



THE SPIRIT OF CRAFTSMANSHIP  
PREVAILS WITH SUBTLE FORMS.  
LIGHT UMBER ETCHED GLASS  
SHADES. PEBBLES FINISH OFFERS  
A GALVANIZED METAL LOOK OR  
ANTIQUÉ BRONZE FINISH.




P7184-144



P7184-20



P4559-144

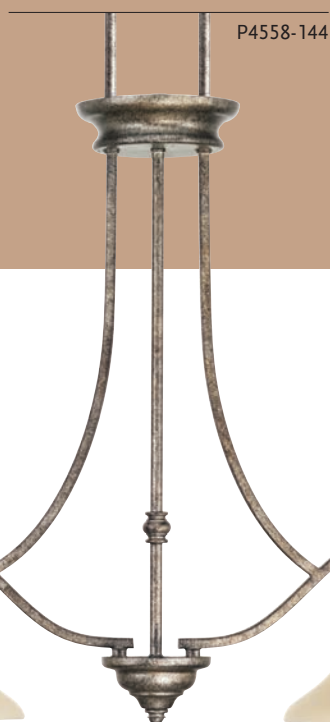

P4558-144

#### TWO-LIGHT LINEAR CHANDELIER

**P4558-20** Antiqué Bronze

**P4558-144** Pebbles

Includes two sets of stems.

Size: 36" L., 13-1/8" W., 23-5/8" ht.

Overall ht. w/stem 90"; wire 15'.

Lamps: Two medium base lamps,  
each 100w max.

#### WALL SCONCE

**P7184-20** Antiqué Bronze

**P7184-144** Pebbles

One-light.

Size: 9-1/2" W., 6-3/4" ht.

Extends 4-3/4". H/CTR 2-7/8".

Lamp: One medium base  
lamp, 100w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

## TRADITIONAL / FORMAL

A HOSPITABLE SOPHISTICATION.  
BURNISHED CHESTNUT OR  
SEABROOK FINISH. ANTIQUE  
ALABASTER GLASS, ROPE  
DETAILS AND PINEAPPLE  
PATTERNED ACCENTS.

### FIVE-LIGHT CHANDELIER

**P4010-42** Seabrook

**P4010-86** Burnished Chestnut

Size: 26-5/8" dia., 28" ht.

Overall ht. w/chain 103";

wire 15'.

Lamps: Five medium base  
lamps, each 100w max.

### FIVE-LIGHT CHANDELIER

**P4120-42** Seabrook

**P4120-86** Burnished Chestnut

Size: 23" dia., 22-3/8" ht.

Overall ht. w/chain 97"; wire 15'.

Lamps: Five candelabra base  
lamps, each 60w max.

### WALL SCONCE

**P7210-42** Seabrook

**P7210-86** Burnished Chestnut

One-light.

Size: 13" W., 7" ht. Extends 6-1/2".

Lamp: One medium base lamp,  
100w max.



P7210-86



P7210-42



Shown: P3204-86 sconce, P4007-86  
chandelier and P3542-86 foyer.

#### Bath & Vanity

pg 437



#### Close-to-ceiling

pg 324





# SAVANNAH



WALL BRACKET

**P3204-42** Seabrook  
**P3204-86** Burnished Chestnut  
 Size: 8-3/4" W., 9-1/4" ht.  
 Extends 9-1/4". H/CTR 6-1/4".  
 Lamp: One medium base  
 lamp, 100w max.  
 Damp location listed.



P3204-86



P3204-42



P4010-86



P4010-42



P4120-86



P4120-42

See pages 298-301 for accessories,  
 including additional chain and  
 stems, stem kits, shades and more.

# SAVANNAH

## THREE-LIGHT CHANDELIER

**P4007-42** Seabrook

**P4007-86** Burnished Chestnut

Size: 21-1/2" dia., 21-1/2" ht.

Overall ht. w/chain 95"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## NINE-LIGHT CHANDELIER

**P4121-42** Seabrook

**P4121-86** Burnished Chestnut

Two-tier.

Size: 33" dia., 30-1/2" ht.

Overall ht. w/chain 153"; wire 15'.

Lamps: Nine medium base lamps, each 100w max.

## MINI-PENDANT

**P5040-42** Seabrook

**P5040-86** Burnished Chestnut

Includes two 12" and two 15" stems with 90° swivel.

Size: 8-3/4" dia., 6-3/4" ht.,

Overall ht. w/stem 63"; wire 15'.

Lamp: One medium base lamp, 100w max.



ANTIQUE ALABASTER GLASS,  
ROPE DETAILS AND PINEAPPLE  
PATTERNED ACCENTS.

THREE-LIGHT FOYER

**P3542-42** Seabrook

**P3542-86** Burnished Chestnut

Glass top diffuser.

Size: 17" dia., 27-1/4" ht.

Overall ht. w/chain 101"; wire 15'.

Lamps: Three medium base lamps,  
each 100w max.

TWELVE-LIGHT CHANDELIER

**P4122-42** Seabrook

**P4122-86** Burnished Chestnut

Three-tier.

Size: 33" dia., 45-3/4" ht.

Overall ht. w/chain 169"; wire 15'.

Lamps: Twelve medium base  
lamps, each 75w max.



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Avalon

## THREE-LIGHT CHANDELIER

**P4067-09** Brushed Nickel

**P4067-20** Antique Bronze

Size: 21-7/8" dia., 21-1/2" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CHANDELIER

**P4070-09** Brushed Nickel

**P4070-20** Antique Bronze

Size: 24-3/8" dia., 15-5/8" ht.

Overall ht. w/chain 91"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CFL CHANDELIER

**P4276-09EBWB** Brushed Nickel

Size: 24-3/8" dia., 15-5/8" ht.

Overall ht. w/chain 91"; wire 15'.

Lamps: Three 13w GU24 CFL lamps included.



P4070-09  
P4276-09EBWB



P4067-09



P4070-20



P4067-20

## MINI-PENDANT

**P5068-09** Brushed Nickel

**P5068-20** Antique Bronze

Includes two 12" and two 15" stems with 90° swivel.

Size: 7-3/4" dia., 6-1/4" ht.

Overall ht. w/stem 63"; wire 15'.

Lamp: One medium base lamp, 100w max.

## CFL MINI-PENDANT

**P5145-09EBWB** Brushed Nickel

**P5145-20EBWB** Antique Bronze

Includes two 12" and two 15" stems with 90° swivel.

Size: 7-3/4" dia., 6-1/4" ht.

Overall ht. w/stem 63"; wire 15'.

Lamp: One 13w GU24 CFL lamp included.



P5068-09  
P5145-09EBWB



P5068-20  
P5145-20EBWB



AVALON FEATURES SOFT CURVES, ALABASTER GLASS AND DOUBLE ROPE DETAILING.

**FIVE-LIGHT CHANDELIER**

**P4057-09** Brushed Nickel

**P4057-20** Antique Bronze

Size: 26-1/2" dia., 22-5/8" ht.

Overall ht. w/chain 96"; wire 15'.

Lamps: Five candelabra base lamps, each 60w max.

**FIVE-LIGHT CHANDELIER**

**P4068-09** Brushed Nickel

**P4068-20** Antique Bronze

Size: 26-1/2" dia., 22-5/8" ht.

Overall ht. w/chain 98"; wire 15'.

Lamps: Five medium base lamps, each 100w max.

**FIVE-LIGHT CFL CHANDELIER**

**P4275-09EBWB** Brushed Nickel

Size: 26-1/2" dia., 22-5/8" ht.

Overall ht. w/chain 98"; wire 15'.

Lamps: Five 13w GU24 CFL lamps included.



P4068-20



P4068-09  
P4275-09EBWB



P4057-20



P4057-09  
shown with optional  
shades P8632-01

Close-to-ceiling

pg 327



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Avalon

## WALL BRACKET

**P3266-09** Brushed Nickel

**P3266-20** Antique Bronze

Size: 7-3/4" W., 12" ht.

Extends 8-3/4".

Lamp: One medium base lamp, 100w max.

## THREE-LIGHT SEMI-FLUSH

**P3467-09** Brushed Nickel

**P3467-20** Antique Bronze

Chain and ceiling mounts both included.

Size: 13-1/8" dia., 15" ht. Overall ht. w/chain 90"; wire 15'.

Lamps: Three medium base lamps, each 75w max.

## TWO-LIGHT CFL FOYER

**P3468-09EBWB** Brushed Nickel

Chain and ceiling mounts both included.

Size: 13-1/8" dia., 15" ht. Overall ht. w/chain 90"; wire 15'.

Lamps: Two 13w GU24 CFL lamps included.



P3773-09



P3773-20



## THREE-LIGHT FOYER PENDANT

**P3773-09** Brushed Nickel

**P3773-20** Antique Bronze

Size: 22" dia., 28" ht. Overall ht. w/chain 103"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

P3467-09  
P3468-09EBWB



P3467-20



P3266-20



P3266-09

AVALON FEATURES SOFT CURVES, ALABASTER GLASS AND DOUBLE ROPE DETAILING.

### THREE-LIGHT FOYER PENDANT

**P3785-09** Brushed Nickel

**P3785-20** Antique Bronze

Glass top diffuser.

Size: 21" dia., 34-1/2" ht.

Overall ht. w/chain 109";

wire 15'.

Lamps: Three medium base lamps, each 100w max.

### FIVE-LIGHT CHANDELIER

**P4069-09** Brushed Nickel

**P4069-20** Antique Bronze

Three-light downlight in bowl.

Size: 26-3/8" dia., 24-1/2" ht.

Overall ht. w/chain 99"; wire 15'.

Lamps: Five medium base lamps, each 100w max., and three medium base lamps, each 100w max. in bowl.



Bath & Vanity

pg 449



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Madison

## WALL BRACKET

**P3161-09** Brushed Nickel

**P3161-20** Antique Bronze

Size: 7-5/8" W., 8" ht. Extends 8-1/2". H/CTR 5".

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT FOYER PENDANT

**P3792-09** Brushed Nickel

**P3792-20** Antique Bronze

Convertible hanging combo fixture. Chain and ceiling mounts both included.

Size: 9-1/2" dia., 14-5/8" ht. Overall ht. w/chain 90"; wire 15'.

Lamp: One medium base lamp, 75w max.

## THREE-LIGHT FOYER PENDANT


**P3794-09** Brushed Nickel

**P3794-20** Antique Bronze

Size: 15-3/4" dia., 36-1/4" ht.

Overall ht. w/chain 111"; wire 15'.

Lamps: Three medium base lamps, each 75w max.

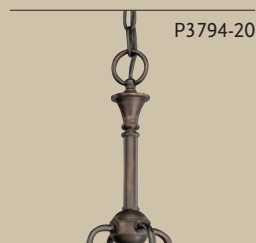

Fan Light Kit

pg 366





ETCHED GLASS WITH  
TRANSITIONAL ELEMENTS.  
TRADITIONAL, SIMPLIFIED VINTAGE  
STYLE.

ONE-LIGHT FOYER  
PENDANT

**P3793-09** Brushed Nickel  
**P3793-20** Antique Bronze  
Size: 11" dia., 21-3/8" ht.  
Overall ht. w/chain 96"; wire 15'.  
Lamp: One medium base  
lamp, 100w max.

REVERSIBLE NINE-LIGHT  
CHANDELIER

**P4283-09** Brushed Nickel  
**P4283-20** Antique Bronze  
Two-tier. Can be installed with  
glass facing up or down.  
Size: 29" dia., 32-3/8" ht.  
Overall ht. w/chain 107"; wire 15'.  
Lamps: Nine medium base  
lamps, each 100w max.

MINI-PENDANT

**P5078-09** Brushed Nickel  
**P5078-20** Antique Bronze  
Includes two 12" and two 15"  
stems with 90° swivel.  
Size: 7-1/2" dia., 8" ht.  
Overall ht. w/stem 52"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

P3793-09



P4283-09  
shown with glass down



P4283-20  
shown with glass up



P5078-09



P3793-20



P5078-20



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Madison

## REVERSIBLE THREE-LIGHT CHANDELIER

**P4280-09** Brushed Nickel

**P4280-20** Antique Bronze

Size: 22" dia., 20" ht. Overall  
ht. w/chain 95"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

## REVERSIBLE FIVE-LIGHT CHANDELIER

**P4281-09** Brushed Nickel

**P4281-20** Antique Bronze

Size: 24-5/8" dia., 25" ht.

Overall ht. w/chain 100"; wire 15'.

Lamps: Five medium base  
lamps, each 100w max.

P4280-20

*Shown with glass up*



P4281-09

*Shown with glass up*



P4280-09

*Shown with glass down*



P4281-20

*Shown with glass down*



Close-to-ceiling

pg 325



Bath & Vanity

pg 440



ETCHED GLASS WITH TRANSITIONAL ELEMENTS. TRADITIONAL, SIMPLIFIED VINTAGE STYLE. REVERSE GLASS TO CAST LIGHT UP OR DOWN.

REVERSIBLE LINEAR CHANDELIER

**P4282-09** Brushed Nickel

**P4282-20** Antique Bronze

Three Light.

Size: 7-5/8" W., 31-1/4" L., 24" ht. Overall ht. w/chain 99"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

PENDANT

**P5079-09** Brushed Nickel

**P5079-20** Antique Bronze

Includes two 12" and two 15" stems with 90° swivel.

Size: 15-3/4" dia., 8-3/4" ht.

Overall ht. w/stem 66"; wire 10'.

Lamp: One medium base lamp, 150w max.

P4282-09

*shown with glass down*



P4282-20

*shown with glass down*



P5079-09



P5079-20



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Trinity



P3807-20

## TWO-LIGHT FOYER

**P3806-09** Brushed Nickel

**P3806-20** Antique Bronze

Size: 12" dia., 18" ht. Overall  
ht. w/chain 93"; wire 15'.

Lamps: Two candelabra base  
lamps, each 60w max.



## THREE-LIGHT FOYER

**P3807-09** Brushed Nickel

**P3807-20** Antique Bronze

Size: 13-1/2" dia., 24" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamps: Three candelabra base  
lamps, each 60w max.



P3806-09



P3806-20

Shown: P3807-09 foyer,  
P4329-09 chandelier and  
P3190-09 wall brackets.

Close-to-ceiling

pg 442





REFRESHING, ROMANTIC FORMS  
WITH ETCHED GLASS OR EXPOSED  
CANDLEHOLDERS.

#### THREE-LIGHT FOYER

**P3474-09** Brushed Nickel

**P3474-20** Antique Bronze

Glass top diffuser.

Size: 18" dia., 24" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

#### THREE-LIGHT CFL FOYER

**P3474-09EBWB** Brushed Nickel

**P3474-20EBWB** Antique Bronze

Glass top diffuser.

Size: 18" dia., 24" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamps: Three 13w GU24 CFL  
lamps, included.



#### FOUR-LIGHT CHANDELIER

**P4326-09** Brushed Nickel

**P4326-20** Antique Bronze

Size: 19" dia., 20" ht. Overall  
ht. w/chain 95"; wire 15'.

Lamps: Four medium base  
lamps, each 100w max.



P3474-20  
P3474-20EBWB



P3474-09  
P3474-09EBWB



P4326-20



P4326-09

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Trinity

## WALL BRACKET

**P3190-09** Brushed Nickel

**P3190-20** Antique Bronze

One-light.

Size: 6-1/2" W., 7-1/2" ht.

Extends 9". H/CTR 3-1/2".

Lamp: One medium base lamp, 100w max.

## CFL WALL BRACKET

**P3190-09EBWB** Brushed Nickel

**P3190-20EBWB** Antique Bronze

One-light.

Size: 6-1/2" W., 7-1/2" ht.

Extends 9". H/CTR 3-1/2".

Lamp: One 13w GU24 CFL lamp, included.



## THREE-LIGHT CHANDELIER

**P4324-09** Brushed Nickel

**P4324-20** Antique Bronze

Size: 19" dia., 20" ht. Overall ht. w/chain 95"; wire 15'.

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CFL CHANDELIER

**P4324-09EBWB** Brushed Nickel

**P4324-20EBWB** Antique Bronze

Size: 19" dia., 20" ht. Overall ht. w/chain 95"; wire 15'.

Lamps: Three 13w GU24 CFL lamps, included.



## FIVE-LIGHT CHANDELIER

**P4328-09** Brushed Nickel

**P4328-20** Antique Bronze

Size: 23" dia., 24" ht. Overall ht. w/chain 99"; wire 15'.

Lamps: Five medium base lamps, each 100w max.

## FIVE-LIGHT CFL CHANDELIER

**P4328-09EBWB** Brushed Nickel

**P4328-20EBWB** Antique Bronze

Size: 23" dia., 24" ht. Overall ht. w/chain 99"; wire 15'.

Lamps: Five 13w GU24 CFL lamps, included.



P4328-09  
P4328-09EBWB



P4328-20  
P4328-20EBWB



P4324-20  
P4324-20EBWB



P4324-09  
P4324-09EBWB



P3190-09  
P3190-09EBWB



P3190-20  
P3190-20EBWB

REFRESHING, ROMANTIC FORMS  
WITH ETCHED GLASS OR EXPOSED  
CANDLEHOLDERS.

#### LINEAR CHANDELIER

**P4325-09** Brushed Nickel

**P4325-20** Antique Bronze

Three-light.

Size: 6-1/2" W., 26-1/2" L.,  
28-1/4" ht. Overall ht. w/chain  
103"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.

#### FIVE-LIGHT CHANDELIER

**P4327-09** Brushed Nickel

**P4327-20** Antique Bronze

Size: 21" dia., 24" ht. Overall  
ht. w/chain 99"; wire 15'.

Lamps: Five candelabra base  
lamps, each 60w max.



P4327-09



P4327-20



P4325-09



P4325-20

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Trinity

## FIFTEEN-LIGHT CHANDELIER

**P4365-09** Brushed Nickel

**P4365-20** Antique Bronze

Three-tier.

Size: 43-3/4" dia., 43-5/8" ht.

Overall ht. w/chain 167"; wire 15'.

Lamps: Fifteen medium base lamps, each 75w max.

## FIFTEEN-LIGHT CFL CHANDELIER

**P4365-09EBWB** Brushed Nickel

**P4365-20EBWB** Antique Bronze

Three-tier.

Size: 43-3/4" dia., 43-5/8" ht.

Overall ht. w/chain 167"; wire 15'.

Lamps: Fifteen 13w GU24 CFL lamps, included.



## PENDANT

**P5095-09** Brushed Nickel

**P5095-20** Antique Bronze

Size: 18" dia., 9-1/2" ht.

Overall ht. w/chain 85";

wire 15'.

Lamp: One medium base lamp, 150w max.

## CFL PENDANT

**P5095-09EBWB** Brushed Nickel

**P5095-20EBWB** Antique Bronze

Size: 18" dia., 9-1/2" ht.

Overall ht. w/chain 85";

wire 15'.

Lamp: One 13w GU24 CFL lamp, included.



P4365-09  
P4365-09EBWB



P5095-09  
P5095-09EBWB



P5095-20  
P5095-20EBWB

## Ceiling Fan

pg 367



## Bath & Vanity

pg 442





REFRESHING, ROMANTIC FORMS  
WITH ETCHED GLASS OR EXPOSED  
CANDLEHOLDERS.



#### TWO-LIGHT FOYER

**P3473-09** Brushed Nickel  
**P3473-20** Antique Bronze  
Chain and ceiling mounts both included.  
Size: 16" dia., 17-1/2" ht. Overall ht. w/chain 93"; wire 15'.  
Lamps: Two medium base lamps, each 100w max.

#### NINE-LIGHT CHANDELIER

**P4329-09** Brushed Nickel  
**P4329-20** Antique Bronze  
Two-tier.  
Size: 30" dia., 33" ht. Overall ht. w/chain 156"; wire 15'.  
Lamps: Nine medium base lamps, each 100w max.

#### NINE-LIGHT CFL CHANDELIER

**P4329-09EBWB** Brushed Nickel  
**P4329-20EBWB** Antique Bronze  
Two-tier.  
Size: 30" dia., 33" ht. Overall ht. w/chain 156"; wire 15'.  
Lamps: Nine 13w GU24 CFL lamps, included.



#### MINI-PENDANT

**P5096-09** Brushed Nickel  
**P5096-20** Antique Bronze  
Includes two 12" and two 15" stems with 90° swivel.  
Size: 6-1/2" dia., 7" ht. Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp, 100w max.

#### CFL MINI-PENDANT

**P5096-09EBWB** Brushed Nickel  
**P5096-20EBWB** Antique Bronze  
Includes two 12" and two 15" stems and 6 links of chain.  
Size: 6-1/2" dia., 7" ht. Overall ht. w/stem 64"; wire 10'.  
Lamp: One 13w GU24 CFL lamp, included.



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Inspire



Close-to-ceiling

pg 325



230

Bath & Vanity

pg 447



Shown: P4638-20 chandelier.

UPDATED TRADITIONAL FEEL WITH GRACIOUS FLOWING OVAL ARMS. BACK TO BASICS DESIGN STYLING. OFF-WHITE LINEN DRUM SHADES.

P4638-20



P4638-09



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

#### NINE-LIGHT CHANDELIER

**P4638-09** Brushed Nickel

**P4638-20** Antique Bronze

Two-tier.

Size: 29-3/8" dia., 31" ht.

Overall ht. w/chain 105";

wire 144".

Lamps: Nine candelabra base lamps, each 60w max.

# Inspire



P4632-09  
shown with  
included shades



P4632-09  
shown without  
included shades

## THREE-LIGHT CHANDELIER

**P4632-09** Brushed Nickel

**P4632-20** Antique Bronze

Size: 17" dia., 18" ht. Overall  
ht. w/chain 92-1/4"; wire 120".

Lamps: Three candelabra base  
lamps, each 60w max.

## MINI-PENDANT

**P5065-09** Brushed Nickel

**P5065-20** Antique Bronze

Chain- or stem-hung mini-pendant.  
Includes 12' of chain and  
two 6" stems.

Size: 6-1/2" dia., 6-1/4" ht. Overall  
ht. w/chain or stem 93"; wire 120".

Lamp: One medium base lamp,  
100w max.



P5065-20



P5065-09



P4635-09



P4632-20  
shown without  
included shades



#### FIVE-LIGHT CHANDELIER

**P4635-09** Brushed Nickel

**P4635-20** Antique Bronze

Size: 23" dia., 20" ht. Overall  
ht. w/chain 94"; wire 120".

Lamps: Five candelabra base  
lamps, each 60w max.

#### CFL SCONCE

**P7026-30** White

Size: 6" W., 9" ht. Extends  
3-7/8". H/CTR 4-1/2".

Lamp: One 13w GU24 CFL  
lamp.



UPDATED TRADITIONAL FEEL WITH  
GRACIOUS FLOWING OVAL ARMS. BACK  
TO BASICS DESIGN STYLING. OFF-WHITE  
LINEN DRUM SHADES.

P4632-20  
shown with  
included shades



P7026-30

P4635-20



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Inspire

## ONE-LIGHT LARGE FOYER PENDANT

**P3799-09** Brushed Nickel

**P3799-20** Antique Bronze

Size: 14-3/4" dia., 20-1/4" ht.,  
Overall ht. w/chain 96"; wire 10'.

Lamp: One medium base lamp,  
100w max.

## THREE-LIGHT INVERTED PENDANT

**P3931-09** Brushed Nickel

**P3931-20** Antique Bronze

White acrylic diffuser.

Size: 19" dia., 21-1/2" ht. Overall  
ht. w/chain 96"; wire 120".

Lamps: Three medium base  
lamps, each 100w max.

## FIFTEEN-LIGHT CHANDELIER

**P4650-09** Brushed Nickel

**P4650-20** Antique Bronze

Three-tier.

Size: 39-1/2" dia., 40-1/4" ht. Overall  
ht. w/chain 163-1/4"; wire 144".

Lamps: Fifteen candelabra base lamps,  
each 60w max.

P3931-09



P3931-20



P4650-09



UPDATED TRADITIONAL FEEL WITH GRACIOUS FLOWING OVAL ARMS. BACK TO BASICS DESIGN STYLING. OFF-WHITE LINEN DRUM SHADES.



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

Gather



P3928-20

#### THREE-LIGHT FOYER

**P3928-09** Brushed Nickel

**P3928-20** Antique Bronze

Size: 10" dia., 16" ht. Overall  
ht. w/chain 61"; wire 96".

Lamps: Three candelabra base  
lamps, each 60w max.

Bath & Vanity

pg 452







Shown: P3928-09 foyer.



SIMPLIFIED FRAME WITH  
UPDATED STYLING AND  
ELEGANT ETCHED GLASS  
SHADES. AVAILABLE IN  
ENERGY STAR VERSIONS.

#### THREE-LIGHT CHANDELIER

**P4440-09** Brushed Nickel  
**P4440-20** Antique Bronze  
Size: 18 1/2" dia., 15" ht. Overall  
ht. w/chain 60"; wire 96".  
Lamps: Three medium base  
lamps, each 100w max.

#### THREE-LIGHT CFL CHANDELIER

**P4440-09EBWB** Brushed Nickel  
**P4440-20EBWB** Antique Bronze  
Size: 18-1/2" dia., 15" ht. Overall  
ht. w/chain 60"; wire 96".  
Lamps: Three 13w GU24 CFL  
lamps, included.



#### FIVE-LIGHT CHANDELIER

**P4441-09** Brushed Nickel  
**P4441-20** Antique Bronze  
Size: 20-1/2" dia., 15" ht.  
Overall ht. w/chain 60";  
wire 96".  
Lamps: Five medium base  
lamps, each 100w max.

#### FIVE-LIGHT CFL CHANDELIER

**P4441-09EBWB** Brushed Nickel  
**P4441-20EBWB** Antique Bronze  
Size: 20-1/2" dia., 15" ht. Overall  
ht. w/chain 60"; wire 96".  
Lamps: Five 13w GU24 CFL  
lamps, included.



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Gather

## NINE-LIGHT CHANDELIER

**P4627-09** Brushed Nickel

**P4627-20** Antique Bronze

Two-tier.

Size: 27-3/4" dia., 20-1/2" ht.

Overall ht. w/chain 84";

wire 120".

Lamps: Nine medium base lamps, each 100w max.

## NINE-LIGHT CFL CHANDELIER

**P4627-09EBWB** Brushed Nickel

**P4627-20EBWB** Antique Bronze

Two-tier.

Size: 27-3/4" dia., 20-1/2" ht.

Overall ht. w/chain 84"; wire 120".

Lamps: Nine 13w GU24 CFL lamps, included.



P4627-20

P4627-20EBWB

## TWO-LIGHT INVERTED PENDANT

**P3914-09** Brushed Nickel

**P3914-20** Antique Bronze

Size: 15" dia., 20-5/8" ht.

Overall ht. w/chain 66";

wire 96".

Lamps: Two medium base lamps, each 100w max.

## TWO-LIGHT INVERTED CFL PENDANT

**P3914-09EBWB** Brushed Nickel

**P3914-20EBWB** Antique Bronze

Size: 15" dia., 20-5/8" ht. Overall ht. w/chain 66"; wire 96".

Lamps: Two 13w GU24 CFL lamps, included.



P3914-09

P3914-09EBWB



P3914-20

P3914-20EBWB



P5113-09

P5113-09EBWB

SIMPLIFIED FRAME WITH UPDATED  
STYLING AND ELEGANT ETCHED GLASS  
SHADES. AVAILABLE IN ENERGY STAR  
VERSIONS.



P4627-09  
P4627-09EBWB

#### SIX-LIGHT FOYER

**P3929-09** Brushed Nickel  
**P3929-20** Antique Bronze  
Size: 15" dia., 24" ht. Overall ht.  
w/chain 87"; wire 120".  
Lamps: Six candelabra base  
lamps, each 60w max.

#### MINI-PENDANT\*

**P5113-09** Brushed Nickel  
**P5113-20** Antique Bronze  
Chain- or stem-hung mini-pendant.  
Size: 4" dia., 5-3/4" ht. Overall ht.  
w/chain/stem 63"; wire 96".  
Lamp: One medium base lamp,  
100w max.

#### CFL MINI-PENDANT\*

**P5113-09EBWB** Brushed Nickel  
**P5113-20EBWB** Antique Bronze  
Chain- or stem-hung mini-pendant.  
Size: 4" dia., 5-3/4" ht. Overall ht.  
w/chain/stem 63"; wire 96".  
Lamp: One 13w GU24 CFL lamp,  
included.



P3929-09



P5113-20  
P5113-20EBWB



P3929-20

\* Includes 42" of chain and  
two 6" stems.

See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Heart



## THREE-LIGHT CHANDELIER

**P4664-09** Brushed Nickel

**P4664-20** Antique Bronze

Size: 22" dia., 18" ht. Overall ht. w/chain 63"; wire 96".

Lamps: Three medium base lamps, each 100w max.

## MINI-PENDANT

**P5131-09** Brushed Nickel

**P5131-20** Antique Bronze

Chain- or stem-hung mini-pendant. Includes 42" of chain and two 6" stems.

Size: 6" dia., 6" ht. Overall ht. w/chain or stem 63"; wire 96".

Lamp: One medium base lamp, 100w max.



Bath & Vanity

pg 448





IRON ARMS MIMIC THE SHAPE OF A HEART. ETCHED GLASS SHADES GIVE A CURVACEOUS AND FLOWING STYLE.



P3955-09



P4666-20

#### THREE-LIGHT INVERTED PENDANT

**P3955-09** Brushed Nickel  
**P3955-20** Antique Bronze  
 Size: 17-3/4" dia., 21-3/4" ht.  
 Overall ht. w/chain 66"; wire 96".  
 Lamps: Three medium base lamps, each 100w max.

#### FIVE-LIGHT CHANDELIER

**P4666-09** Brushed Nickel  
**P4666-20** Antique Bronze  
 Size: 25-1/2" dia., 19-1/8" ht.  
 Overall ht. w/chain 63"; wire 96".  
 Lamps: Five medium base lamps, each 100w max.



P3955-20



P4666-09

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Heart



P4668-09

## NINE-LIGHT CHANDELIER

**P4668-09** Brushed Nickel

**P4668-20** Antique Bronze

Two-tier.

Size: 30" dia., 27-3/4" ht. Overall  
ht. w/chain 90"; wire 144".

Lamps: Nine medium base  
lamps, each 100w max.



P4668-20

IRON ARMS MIMIC THE SHAPE OF A HEART. CANDELABRA VERSION OR ETCHED GLASS SHADES GIVE A CURVACEOUS AND FLOWING STYLE.

#### TWELVE-LIGHT CHANDELIER

**P4686-09** Brushed Nickel

**P4686-20** Antique Bronze

Three-tier.

Can be used with glass or without. Includes 6' of chain and two 6" stems.

Size: 36" dia., 31-1/2" ht.

Overall ht. w/chain or stem 155"; wire 15".

Lamps: Twelve candelabra base lamps, each 60w max.



P4686-20



P4686-09

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Bedford



P3367-20

P3367-09



P3788-20



P4390-20

## WALL BRACKET

**P3367-09** Brushed Nickel

**P3367-20** Antique Bronze

Size: 5-1/4" W., 8-1/2" ht.

Extends 7-1/4". H/CTR 3-1/16".

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT FOYER

**P3788-09** Brushed Nickel

**P3788-20** Antique Bronze

Chain and ceiling mounts both included.

Size: 10-1/2" dia., 14-1/2" ht.

Overall ht. w/chain 54"; wire 15'.

Lamp: One medium base lamp, 150w max.



P3788-09

## THREE-LIGHT CHANDELIER

**P4390-09** Brushed Nickel

**P4390-20** Antique Bronze

Size: 19-1/2" dia., 15-5/8" ht.

Overall ht. w/chain 54"; wire 15'.

Lamps: Three medium base lamps, each 100w max.



P4390-09



CAPTURE A ROMANTIC FEEL WITH SOFT, SWIRLING FORMS, CURVED DOUBLE ARMS AND ETCHED ALABASTER GLASS.

PENDANT

**P5090-09** Brushed Nickel

**P5090-20** Antique Bronze


Size: 15-5/8" dia., 11-1/4" ht.,  
Overall ht. w/chain 50"; wire 15'.  
Lamp: One medium base lamp,  
150w max.

FIVE-LIGHT CHANDELIER

**P4391-09** Brushed Nickel

**P4391-20** Antique Bronze

Size: 22-1/2" dia., 16" ht.  
Overall ht. w/chain 91"; wire 15'.  
Lamps: Five medium base  
lamps, each 100w max.

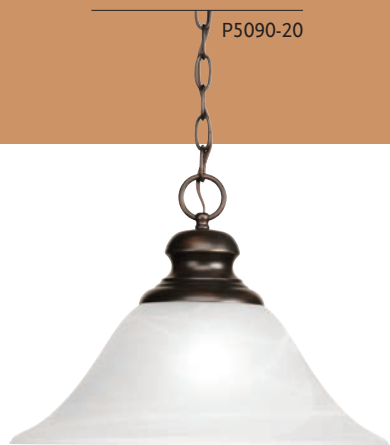

Bath & Vanity

pg 456



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Americana

## FIVE-LIGHT CHANDELIER

**P4355-09** Brushed Nickel

**P4355-10** Polished Brass

**P4355-20** Antique Bronze

Size: 23-1/4" dia., 18-1/4" ht.

Overall ht. w/chain 58"; wire 15'.

Lamps: Five candelabra base lamps, each 60w max.

## SIX-LIGHT CHANDELIER

**P4356-09** Brushed Nickel

**P4356-10** Polished Brass

**P4356-20** Antique Bronze

Size: 23-1/4" dia., 18" ht. Overall

ht. w/chain 57"; wire 15'.

Lamps: Six candelabra base lamps, each 60w max.

P4356-10



P4356-09



P4356-20



P4355-09



P4355-10



P4355-20



A TIMELESS COLLECTION WITH SUBTLE, ELEGANT DETAILS. THE DELICATE CAST SCROLL ARMS ENHANCE ANY AMBIENCE. FEATURES DECORATIVE CENTER COLUMNS AND TRADITIONAL CANDLE LIGHTS.

#### FIVE-LIGHT CHANDELIER

**P4346-09** Brushed Nickel

**P4346-10** Polished Brass

**P4346-20** Antique Bronze

Size: 24" dia., 17" ht. Overall ht. w/chain 53"; wire 15'.

Lamps: Five candelabra base lamps, each 60w max.

#### THREE-LIGHT CHANDELIER

**P4354-09** Brushed Nickel

**P4354-20** Antique Bronze

Chain and ceiling mountings both included.

Size: 13" dia., 12-7/8" ht. Overall ht. w/chain 53", wire 10'.

Lamps: Three candelabra base lamps, each 60w max.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Americana

## WALL BRACKET

**P3801-10** Polished Brass  
One-light.  
Size: 4-3/8" W., 13-1/8" ht.  
Extends 8-5/8". H/CTR 9-1/4".  
Lamp: One candelabra base  
lamp, 60w max.

## WALL BRACKET

**P3802-10** Polished Brass  
Two-light.  
Size: 12-7/8" W., 13-1/8" ht.  
Extends 7-3/4". H/CTR 9-1/4".  
Lamps: Two candelabra base  
lamps, each 60w max.

## EIGHT-LIGHT CHANDELIER

**P4357-09** Brushed Nickel  
**P4357-10** Polished Brass  
**P4357-20** Antique Bronze  
Size: 26" dia., 18" ht. Overall ht.  
w/chain 54"; wire 15'.  
Lamps: Eight candelabra base  
lamps, each 60w max.



P3802-10



P3801-10



P4357-20



P4357-09

## TEN-LIGHT CHANDELIER

**P4358-09** Brushed Nickel  
**P4358-20** Antique Bronze  
Two-tier.  
Size: 26" dia., 23" ht. Overall ht.  
w/chain 67"; wire 15'.  
Lamps: Ten candelabra base  
lamps, each 60w max.



P4357-10



## FIFTEEN-LIGHT CHANDELIER

**P4359-09** Brushed Nickel  
**P4359-20** Antique Bronze  
Three-tier.  
Size: 26" dia., 27-1/4" ht. Overall  
ht. w/chain 66"; wire 15'.  
Lamps: Fifteen candelabra  
base lamps, each 60w max.



Optional fabric shades  
P8639-01



See page 298 for these and  
other shade options for  
Americana



A TIMELESS COLLECTION WITH SUBTLE, ELEGANT DETAILS. THE DELICATE CAST SCROLL ARMS ENHANCE ANY AMBIENCE. FEATURES DECORATIVE CENTER COLUMNS AND TRADITIONAL CANDLE LIGHTS.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

## Drum Shade

### FIVE-LIGHT CHANDELIER

**P4217-09** Brushed Nickel

**P4217-20** Antique Bronze

Off white linen drum shade.

Size: 21-5/8" dia., 21-1/8" ht. Overall

ht. w/chain 66"; wire 126".  
Lamps: Five candelabra base lamps,  
each 60w max.



## Prismatic Glass

### THREE-LIGHT CHANDELIER

**P4094-09** Brushed Nickel

**P4094-20** Antique Bronze

Size: 19-3/4" dia., 11-7/8" ht.

Overall ht. w/chain 45"; wire 10'.

Lamps: Three medium base lamps,  
each 100w max.

### FOUR-LIGHT CHANDELIER

**P4095-09** Brushed Nickel

Size: 22-7/8" dia., 13-3/8" ht.

Overall ht. w/chain 47"; wire 10'.

Lamps: Four medium base  
lamps, each 100w max.



## Classic

### FIVE-LIGHT CHANDELIER

**P4008-09** Brushed Nickel

**P4008-20** Antique Bronze

**P4008-31** Black

Size: 21" dia., 16-1/2" ht.

Overall ht. w/chain 42"; wire 10'.

Lamps: Five candelabra base lamps, each 60w max.

### FIVE-LIGHT CHANDELIER

**P4009-09** Brushed Nickel

**P4009-10** Polished Brass

**P4009-20** Antique Bronze

Size: 17-1/2" dia., 15" ht.

Overall ht. w/chain 50"; wire 10'.

Lamps: Five candelabra base lamps, each 60w max.

## Alabaster Glass

### FOUR-LIGHT FOYER

**P3458-09** Brushed Nickel

**P3458-20** Antique Bronze

Swirled alabaster glass.

Size: 15-7/8" dia., 25-7/8" ht. Overall

ht. w/chain 101"; wire 15'.

Lamps: Three medium base lamps, each 60w max.



P4009-10



P4009-20



P3458-20



P3458-09



P4009-09



P4008-09



P4008-31



P4008-20

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Bound Beveled Glass

BRUSHED NICKEL OR ANTIQUE BRONZE  
FINISH. SOLID BRASS FRAME, CLEAR  
BEVELED GLASS PANELS.

## THREE-LIGHT FOYER

**P3716-09** Brushed Nickel

**P3716-20** Antique Bronze

Six-sided.

Size: 12-1/2" dia., 20-3/8" ht.

Overall ht. w/chain 42"; wire 13'.

Lamps: Three candelabra base  
lamps, each 60w max.

## SIX-LIGHT FOYER

**P3779-09** Brushed Nickel

**P3779-20** Antique Bronze

Six-sided. Hinged panel for ease  
of relamping.

Size: 12-1/4" dia., 31-3/4" ht.

Overall ht. w/chain 68"; wire 13'.

Lamps: Six candelabra base  
lamps, each 60w max.

Close-to-ceiling

pg 350



P3716-09



P3716-20



P3779-09



# Entryway

## THREE-LIGHT FOYER

**P3645-09** Brushed Nickel

**P3645-20** Antique Bronze

Six-sided. Chain and ceiling

mountings both included.

Size: 9" dia., 15-1/4"ht. Overall

ht. w/chain 48"; wire 10'.

Lamps: Three candelabra base  
lamps, each 60w max.

## ONE-LIGHT FOYER

**P5834-10** Polished Solid Brass

Six-sided. Chain and ceiling

mountings both included.

Size: 7" dia., 10"ht. Overall ht.

w/chain 39-1/2"; wire 10'.

Lamp: One medium base  
lamp, 100w max.



P3690-20



P3645-09



P3690-09



P3645-20



P5834-10



## Seeded Glass



### THREE-LIGHT FOYER

**P3753-09** Brushed Nickel

**P3753-20** Antique Bronze

Size: 9-3/4" dia., 24-1/2" ht.

Overall ht. w/chain 98"; wire 15'.

Lamps: Three candelabra base lamps, each 60w max.

### SIX-LIGHT FOYER

**P3754-09** Brushed Nickel

**P3754-20** Antique Bronze

Size: 14-1/4" dia., 36-1/2" ht.

Overall ht. w/chain 158"; wire 15'.

Lamps: Six candelabra base lamps, each 60w max.



*Shown: P3753-20 pendants.*



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Eclipse



## THREE-LIGHT PENDANT

**P3486-20** Antique Bronze  
Size: 19-3/8" dia., 17" ht. Overall  
ht. w/chain 56"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT PENDANT

**P3573-09** Brushed Nickel  
Size: 19-3/8" dia., 17" ht. Overall  
ht. w/chain 56"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT PENDANT

**P7322-09WB** Brushed Nickel  
**P7322-20WB** Antique Bronze  
120V NPF electronic ballast.  
Size: 19-3/8" dia., 17" ht.  
Overall ht. w/chain 56"; wire 15'.  
Lamps: Three 26w 4-pin Quad CFL  
included. G24q-3 base.



*Shown: P3486-20 chandeliers with  
Progress Lighting recessed and  
undercabinet lighting.*

Wall Sconce  
pg 494



Close-to-ceiling  
pg 340



POLISHED BRASS, BRUSHED NICKEL  
AND ANTIQUE BRONZE FINISHES WITH  
SATIN WHITE GLASS. PERFECT FOR RESIDENTIAL  
AND COMMERCIAL APPLICATIONS.



P3573-09  
P7322-09WB



P3575-10



P3487-20  
P7323-20WB

#### FOUR-LIGHT PENDANT

**P3575-09** Brushed Nickel

**P3575-10** Polished Brass

Size: 27-3/8" dia., 24" ht. Overall

ht. w/chain 63"; wire 15'.  
Lamps: Four medium base lamps,  
each 100w max.

#### FOUR-LIGHT PENDANT

**P3487-20** Antique Bronze

Size: 27-3/8" dia., 24-1/8" ht.

Overall ht. w/chain 63"; wire 15'

Lamps: Four medium base lamps,  
each 100w max.

#### FOUR-LIGHT PENDANT

**P7323-09WB** Brushed Nickel

**P7323-20WB** Antique Bronze

120V NPF electronic ballast.

Size: 27-3/8" dia., 24-1/8" ht.

Overall ht. w/chain 63"; wire 15'.

Lamps: Four 26w 4-pin Quad CFL  
included. G24q-3 base.



P3575-09  
P7323-09WB



P3486-20  
P7322-20WB



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Marker

CREATED WITH MID-CENTURY  
DESIGNS IN MIND. ADD A SPLASH  
OF VINTAGE MODERN FLAIR WITH  
A VARIETY OF FABRICS, SHADE SIZES  
AND PENDANT KITS

## 22" DRUM SHADES

Acrylic bottom diffuser.

For use with P5198 or P5199.

Size: 22" dia., 10" ht.

**P8768-01** Chloe Floral Fabric

**P8824-01** Black Parchment Paper

**P8825-01** Beige Silken Fabric

**P8825-01**

*shown with*

*P5199-09 pendant kit*



**P8768-01**

*shown with*

*P5199-20 pendant kit*



**P8824-01**

*shown with*

*P5199-20 pendant kit*



## 10" DRUM SHADES

Acrylic bottom diffuser.

For use with P5198 only.

Size: 10" dia., 8" ht.

**P8820-01** Black Parchment

Paper with White Liner

**P8821-01** Beige Silken Fabric

## 9" DRUM SHADE

Acrylic bottom diffuser.

For use with P5198 only.

Size: 9" dia., 8" ht.

**P8928-01** Chiffon Ribbon Fabric

**P8928-01**

*shown with*

*P5198-09 pendant kit*



**P8821-01**

*shown with*

*P5198-09 pendant kit*

**P8820-01**

*shown with*

*P5198-20 pendant kit*





P8823-01  
shown with  
P5199-20 pendant kit



P8929-01  
shown with  
P5198-09 pendant kit



P8822-01  
shown with  
P5199-09 pendant kit



P8766-01  
shown with  
P5199-09 pendant kit



#### 16" DRUM SHADE

Acrylic bottom diffuser.

For use with P5198 or P5199.

Size: 16" dia., 10" ht.

**P8766-01** Chloe Floral Fabric

**P8822-01** Black Parchment Paper  
with White Liner

**P8823-01** Beige Silken Fabric

**P8929-01** Chiffon Ribbon Fabric

Can be used with P5198 only.

### Pendant Kits for Markor Shades

Shades and pendant kits are sold separately. 9" and 10" shades can be used only with pendant kit P5198. 16" and 22" shades can be used with pendant kit P5199 or P5199. See page 255 for ordering information.

#### ONE-LIGHT PENDANT KIT

**P5198-09** Brushed Nickel

**P5198-20** Antique Bronze

One-light pendant kit for use with all Markor shades.

Size: 1-5/8" dia., 5-5/8" ht. Overall

ht. w/stem and lamps 66"; wire 10'.

Lamp: One medium base lamp,  
100w max.

#### THREE-LIGHT PENDANT KIT

**P5199-09** Brushed Nickel

**P5199-20** Antique Bronze

Three-light pendant kit for use with most 16" and 22" shades only.

Size: 4-3/4" dia., 6-1/4" ht. Overall

ht. w/stem and lamps 64"; wire 10'.

Lamps: Three medium base lamps,  
each 100w max.

P5198-20



P5199-09



Stems include two 6", one 12" and  
two 15" stems with 90° swivel.

CONTEMPORARY / SOFT

# Markor



*P8824-01 22" drum shade and  
P5199-09 pendant kit.*

## Modular Pendant System &amp; Ordering

SIMPLE TO ORDER.  
SPECIFY TWO SEPARATE  
PIECES – FABRIC SHADE AND  
STEM KIT OF YOUR CHOICE.

 
## Step 1: Choose a fabric



Chiffon ribbon fabric



Chloe floral pattern

Black parchment paper  
with white liner

Beige silken fabric

## Step 2: Select a shade size

## 9" SMALL SHADE

**P8928-01** Chiffon Ribbon Fabric

## 10" SMALL SHADE

**P8820-01** Black Parchment Paper

**P8821-01** Beige Silken Fabric



## Step 3: Select a stem kit

## P5198 ONE-LIGHT PENDANT KIT

**P5198-09** Brushed Nickel

**P5198-20** Antique Bronze

*9" and 10" small shades can only be used  
with P5198 one-light pendant kit*



## 16" MEDIUM SHADE

**P8766-01** Chloe Floral Fabric

**P8822-01** Black Parchment Paper

**P8823-01** Beige Silken Fabric

**P8929-01** Chiffon Ribbon Fabric

*16" medium shades can be used  
with P5198 one-light pendant kit  
or P5199 three-light pendant kit*



## P5199 THREE-LIGHT PENDANT KIT

**P5199-09** Brushed Nickel

**P5199-20** Antique Bronze

OR

## P5198 ONE-LIGHT PENDANT KIT

**P5198-09** Brushed Nickel

**P5198-20** Antique Bronze



## 22" LARGE SHADE

**P8768-01** Chloe Floral Fabric

**P8824-01** Black Parchment Paper

**P8825-01** Beige Silken Fabric

*22" large shades can be used with  
P5198 one-light pendant kit or  
P5199 three-light pendant kit*



## P5199 THREE-LIGHT PENDANT KIT

**P5199-09** Brushed Nickel

**P5199-20** Antique Bronze

OR

## P5198 ONE-LIGHT PENDANT KIT

**P5198-09** Brushed Nickel

**P5198-20** Antique Bronze



# Bingo

FASHION FORWARD CIRCULAR FORMS DEFINE THE BINGO COLLECTION. ETCHED OPAL GLASS SHADES ARE LAYERED WITH AN IRONWORK PATTERN OF CIRCLES.

THREE-LIGHT PENDANT  
**P5014-09** Brushed Nickel  
**P5014-74** Venetian Bronze  
Size: 18" dia., 9-3/8" ht., Overall  
ht. w/stem 76"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

MINI-PENDANT  
**P5314-09** Brushed Nickel  
**P5314-74** Venetian Bronze  
Size: 8" dia., 12-3/4" ht., Overall  
ht. w/stem 79"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



All stem hung pendants on these pages include one 6" stem, four 12" stems and 6 links of chain.

See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Dazzle

CLEAR GLASS OUTSIDE WITH  
GLISTENING BEADED TEXTURE INSIDE.

## MINI-PENDANT

**P5017-09** Brushed Nickel

Size: 9-3/4" dia., 16" ht. Overall ht.  
w/chain 90"; wire 10'.

Lamp: One medium base lamp,  
100w max.



# The Pointe

ALTERNATING CLEAR AND  
CHAMPAGNE K9 GLASS ACCENTS.

## MINI-PENDANT

**P5043-15** Polished Chrome

Size: 6-1/8" sq., 8" ht. Overall ht.  
w/stem 74"; wire 10'.

Lamp: One medium base lamp,  
100w max.



## MINI-PENDANT

**P5051-15** Polished Chrome

Size: 6" dia., 9-3/8" ht. Overall ht.  
w/stem 75"; wire 10'.

Lamp: One candelabra base  
lamp, 60w max.





# Nissé

SILVER CHIFFON SHADE SURROUNDED BY CLEAR ACRYLIC RODS.



P5105-104



P3881-104



## FOUR-LIGHT PENDANT

**P3881-104** Polished Nickel  
Size: 20" dia., 22-1/2" ht. Overall  
ht. w/chain 97"; wire 15'.  
Lamps: Four candelabra base  
lamps, each 60w max.

## OVAL MINI-PENDANT

**P5019-104** Polished Nickel  
Opal glass with clear glass disc.  
Size: 5-1/2" L., 3-1/2" W., 6-7/8"  
ht. Overall ht. w/stem 73";  
wire 120".  
Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5105-104** Polished Nickel  
Size: 6" dia., 7-3/8" ht. Overall  
ht. w/ stem 72";  
wire 120".  
Lamp: One medium base lamp,  
100w max.



P5019-104

*Shown: P3881-104 pendant.*

# Status

WHITE FABRIC SHADE PAIRED WITH POLISHED CHROME FINISH. ETCHED GLASS BOTTOM DIFFUSER.

## MINI-PENDANT

**P5031-15** Polished Chrome  
Size: 6" dia., 11-1/8" ht. Overall ht.  
w/stem 77"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



P5031-15




P5019-104  
Top View

*All stem hung pendants on these pages include one 6" stem, four 12" stems and 6 links of chain.*

# Caress

ETCHED GLASS DIFFUSER INSIDE  
CLEAR WATERGLASS SHADE

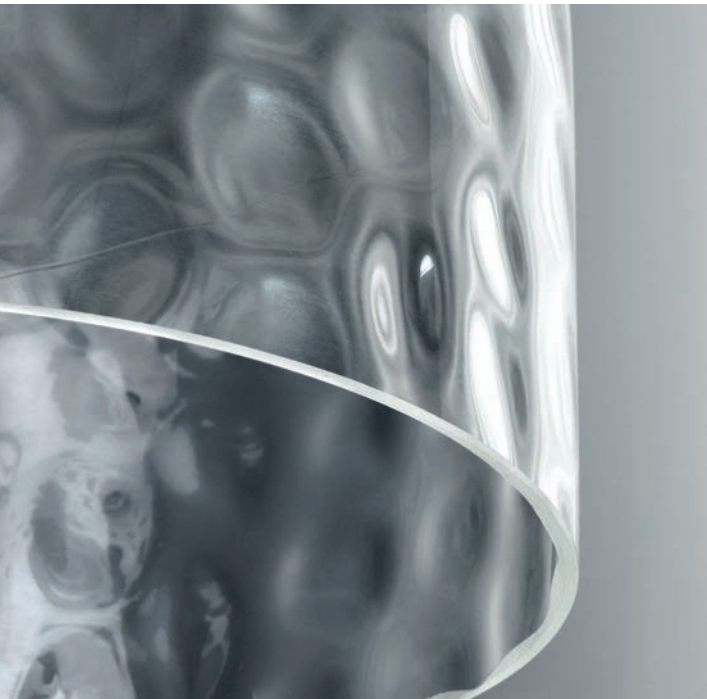

## MINI-PENDANT

**P5044-104WB** Polished Nickel  
Size: 6-3/8" dia., 10-3/4" ht. Overall  
ht w/chain or stem 77"; wire 180".  
Lamp: One candelabra base krypton  
lamp, 60w max., (included).

## MINI-PENDANT

**P5306-104WB** Polished Nickel  
Size: 8" dia., 12-1/2" ht., Overall ht.  
w/stem 78"; wire 15".  
Lamp: One candelabra base  
krypton lamp, 60w max (included).



# Indulge

CLEAR GLASS SHADE WITH  
ETCHED GLASS INSIDE.

## MINI-PENDANT

**P5171-20** Antique Bronze  
Size: 5" dia., 8-3/8" ht. Overall ht.  
w/stem 74"; wire 15".  
Lamp: One medium base lamp,  
100w max.



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Fortune

K9 GLASS ORB ACCENTS ON A  
POLISHED NICKEL FRAME.



## MINI-PENDANT

**P5007-104** Polished Nickel  
Etched opal shade.  
Size: 8-7/8" dia., 9-3/4" ht. Overall  
ht. w/chain or stem 76"; wire 120".  
Lamp: One candelabra base G16-1/2  
lamp, 60w max.

## THREE-LIGHT PENDANT

**P5034-104** Polished Nickel  
White linen shade with  
bottom diffuser.  
Size: 20-1/4" dia., 15-5/8" ht.  
Overall ht. w/chain 82";  
wire 180".  
Lamps: Three medium base  
lamps, each 100w max.

*All Fortune pendants include 72"  
of chain and two 6" stems.*



*Shown: P5007-104 mini-pendants.*

# Roxbury

CRYSTAL GLASS SHADE WITH  
CLASSIC SILVER FINISH.

## MINI-PENDANT

**P5100-101** Classic Silver  
Size: 7" dia., 10-7/8" ht.  
Overall ht. w/stem 67"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

*Includes two 12" stems, two 15"  
stems with 90° hang straight.*



# Equinox

CONCENTRIC CIRCULAR FRAME.



P5142-20

Chandelier, Foyer & Pendants



Shown: P5142-126 pendants.



P5142-126



P7077-104

## THREE-LIGHT SPHERE PENDANT

**P5142-20** Antique Bronze  
**P5142-126** Burnished Silver  
 Size: 10-1/8" dia., 12-1/2" ht.,  
 Overall ht. w/chain 87"; wire 15'.  
 Lamps: Three candelabra base  
 lamps, each 60w max.

## ONE-LIGHT PENDANT

**P7077-104** Polished Nickel  
 Etched opal glass  
 Size: 11-3/8" dia., 12-1/16" ht.,  
 Overall ht. w/chain 78"; wire 10'.  
 Lamp: One medium base lamp,  
 100w max.

# Entice

DIAMOND PATTERNED, CLEAR  
 GLASS AND A BRIGHT POLISHED  
 NICKEL FINISH.

## MINI-PENDANT

**P5041-104** Polished Nickel  
 Size: 5-1/2" dia., 6-3/4" ht. Overall  
 ht. w/stem 75"; wire 10'.  
 Lamp: One medium base lamp,  
 100w max.



P5041-104

*All stem hung pendants on this  
 page include one 6" stem, four  
 12" stems and 6 links of chain.*

*See pages 298-301 for accessories,  
 including additional chain and  
 stems, stem kits, shades and more.*

# Ashbury

DOUBLE DRUM LINEN SHADES  
FOR AN URBAN TWIST.

## MINI-PENDANT

**P5054-134** Silver Ridge

Size: 10" dia., 17-1/2" ht.

Overall ht. w/stem 75"; wire 10'.

Lamp: One medium  
base lamp, 100w max.

*Includes two 6", one 12" and two  
15" stems with 90° hang straight.*



P5054-134

## THREE-LIGHT PENDANT

**P5056-134** Silver Ridge

Size: 22" dia., 28-1/2" ht. Overall

ht. w/chain 105"; wire 15'.

Lamps: Three medium base  
lamps, each 100w max.



P5056-134



*Shown: P5054-134 mini-pendants.*

# Applause

NATURAL PARCHMENT GLASS IN  
TRADITIONAL IRON FORM.

## MINI-PENDANT

**P5010-20** Antique Bronze

Size: 7" dia., 6-1/2" ht. Overall

ht. w/stem 73"; wire 10'.

Lamp: One medium  
base lamp, 100w max.



P5010-20

# Stroll

OPAL GLASS SHADE.

## MINI-PENDANT

**P5033-144** Pebbles

Size: 4-3/4" dia., 7-1/4" ht.

Overall ht. w/stem 74"; wire 10'.

Lamp: One medium  
base lamp, 100w max.



P5033-144

*All stem hung pendants on these  
pages include one 6" stem, four  
12" stems and 6 links of chain,  
unless otherwise noted.*



# Cuddle

MYLAR EXTERIOR SHADE SURROUNDS  
LINEN INTERIOR SHADE. ACRYLIC  
BOTTOM DIFFUSER.



P5037-09



P5036-09



P5037-20



P5036-20

## ONE-LIGHT PENDANT

**P5036-09** Brushed Nickel

**P5036-20** Antique Bronze

Size: 16" dia., 9-1/4" ht. Overall  
ht. w/ one 6" stem 16-1/4";  
wire 10'.

Lamp: One medium base lamp,  
100w max.

## THREE-LIGHT PENDANT

**P5037-09** Brushed Nickel

**P5037-20** Antique Bronze

Size: 22" dia., 7-1/4" ht. Overall  
ht. w/ one 6" stem 13-3/4";  
wire 10'.

Lamps: Three medium base  
lamps, each 100w max.

# Compass

ETCHED OPAL GLASS SHADE WITH  
K9 GLASS ORB.

## MINI-PENDANT

**P5016-20** Antique Bronze

Size: 5-7/8" dia., 9-5/8" ht. Overall  
ht. w/stem 76"; wire 10'.

Lamp: One medium base lamp,  
100w max.



P5016-20

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Clayton

CLASSIC VINTAGE STYLING MEETS  
MINIMALISTIC LINES. MODERN DRUM  
SHADES IN CREAM LINEN FABRIC.



Shown: P5256-84 mini-pendants.

## MINI-PENDANT

**P5256-84 Espresso**  
Size: 8-1/8" dia., 9" ht.  
Overall ht. w/stem 66"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.

## THREE-LIGHT PENDANT

**P3909-84 Espresso**  
Bottom glass diffuser.  
Size: 20" dia., 21-7/8" ht.  
Overall ht. w/stem 79"; wire 10'.  
Lamps: Three medium base  
lamps, each 100w max.

*All stem hung pendants on this page  
include two 6" stems, one 12" stem and  
one 15" stem with 90° swivel.*



# Mingle

DECORATIVE METAL FRAME THAT HIGHLIGHTS CONCENTRIC CIRCULAR SHAPES. BRUSHED NICKEL HAS ETCHED WHITE PARCHMENT GLASS AND ANTIQUE BRONZE HAS ETCHED NATURAL PARCHMENT GLASS.

## MINI-PENDANT

**P5038-09** Brushed Nickel

**P5038-20** Antique Bronze

Size: 6" dia., 6-3/8" ht.

Overall ht. w/stem 79"; wire 10'.

Lamp: One medium base lamp, 100w max.

## THREE-LIGHT PENDANT

**P5155-09** Brushed Nickel

**P5155-20** Antique Bronze

Size: 17" dia., 15-1/4" ht.

Overall ht. w/stem 81"; wire 15'.

Lamp: Three medium base lamps, each 100w max.

## FOUR-LIGHT PENDANT

**P5156-09** Brushed Nickel

**P5156-20** Antique Bronze

Size: 21" dia., 15-1/4" ht.

Overall ht. w/stem 81"; wire 15'.

Lamp: Four medium base lamps, each 100w max.



*All stem hung pendants on this page include one 6" stem, four 12" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*

# Santiago

GET INSPIRED WITH SUBTLE,  
SPIRALING DETAILS. JASMINE MIST  
GLASS WITH FORGED IRON TWISTS.



*Shown: P5076-102 mini-pendants.*

P5076-102

P5076-80



## MINI-PENDANT

**P5076-80** Forged Black

**P5076-102** Roasted Java

Size: 6-1/4" w., 15-1/4" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base

base lamp, 100w max.

# Fiorentino

CLEAR SEEDED GLASS AND HAND-  
PAINTED FORGED BRONZE FINISH.

## MINI-PENDANT

**P5140-77** Forged Bronze

Size: 11-1/8" dia., 11-1/2" ht.

Overall ht. w/stem 69"; wire 10'.

Lamp: One medium base lamp,  
100w max.

P5140-77



*All stem hung pendants on these  
pages include two 12" stems and two  
15" stem with 90° hang straight.*

# Le Jardin

OLD WORLD QUALITY WITH ELEGANT DETAILS. WEATHERED SANDSTONE GLASS HIGHLIGHTS RIBBED ACCENTS.

## MINI-PENDANT

**P5083-84** Espresso

Size: 7" dia., 17" ht.

Overall ht. w/stem 74"; wire 10'.

Lamp: One medium base lamp, 100w max.

## PENDANT

**P5122-84** Espresso

Size: 15-3/4" dia., 19-1/4" ht.

Overall ht. w/chain 94"; wire 15'.

Lamp: One medium base lamp, 150w max.



# Club

TEA STAINED GLASS WITH A CHISELED ANGULAR PRISM IN A DISTRESSED FINISH.

## MINI-PENDANT

**P5039-20** Antique Bronze

Size: 9-3/4" dia., 16" ht. Overall ht. w/chain 90"; wire 10'.

Lamp: One medium base lamp, 100w max.



*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*



# Arts & Crafts

LIGHT HONEY ART GLASS AND  
MICA ACCENT PANELS.



Shown: P5020-46 mini-pendants.

# Melbourne

ETCHED WATERMARK WITH  
AN ESPRESSO FINISH.

## MINI-PENDANT

**P5000-84 Espresso**  
Size: 9" dia., 9-1/8" ht.  
Overall ht. w/stem 66";  
wire 10'.  
Lamp: One medium  
base lamp, 100w max.

## PENDANT

**P5001-84 Espresso**  
Size: 14" dia., 10" ht.  
Overall ht. w/stem 67";  
wire 15'.  
Lamp: One medium  
base lamp, 150w max.



## MINI-PENDANT

**P5020-46 Weathered Bronze**  
Includes one 18" stem and 72" chain  
Size: 8-1/2" sq., 27-3/4" ht.,  
Overall ht. w/chain 102"; wire 15'.  
Lamp: One medium base lamp,  
100w max.



# Riverside

ETCHED LIGHT TOPAZ GLASS  
IN AN HEIRLOOM FINISH.



## MINI-PENDANT

**P5002-88 Heirloom**  
Size: 4-3/4" dia., 7-3/4" ht.  
Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



*All pendants on these pages include two  
12" stems, two 15" stems with 90° hang  
straight, unless otherwise noted.*

# Kensington

ETCHED SWIRL FINISH WITH BRUSHED NICKEL, AND  
CARMEL SWIRL FINISH WITH FORGED BRONZE.

## MINI-PENDANT

**P5141-09** Brushed Nickel

**P5141-77** Forged Bronze

Size: 7" dia., 7-1/2" ht.

Overall ht. w/stem 65"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*Includes two 6" stems, one  
12" stem and one 15" stem  
with 90° swivel.*



# Torino

BRUSHED NICKEL WITH WHITE  
FROSTED GLASS. FORGED BRONZE  
WITH TEA-STAINED GLASS.

## PENDANT

**P5144-09** Brushed Nickel

**P5144-77** Forged Bronze

Stem and ceiling mounts both  
included.

Size: 13-1/8" dia., 15-1/8" ht.

Overall ht. w/stem 66"; wire 10'.

Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5153-09** Brushed Nickel

**P5153-77** Forged Bronze

Size: 7-1/2" dia., 11" ht. Overall  
ht. w/stem 68"; wire 10'.

Lamp: One medium base lamp,  
100w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Legend

SMOOTH POLISHED OUTSIDE  
GLASS WITH NATURE-INSPIRED  
PATTERN INSIDE.



## MINI-PENDANT

**P5032-09** Brushed Nickel

**P5032-20** Antique Bronze

Size: 7" dia., 6-1/2" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp,  
100w max.

# Renovations

REFRESH YOUR LOOK WITH  
ETCHED OPAL RIBBED GLASS.

## MINI-PENDANT

**P5104-77** Forged Bronze

**P5104-81** Antique Nickel

Size: 6" dia., 6-7/8" ht.

Overall ht. w/stem 63"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*Includes two 12" stems, two  
15" stems with 90° swivel.*



*Shown: P5104-81 mini-pendants.*

# Cantata

SEEDED TOPAZ GLASS FINISHED IN  
FORGED BRONZE. ETCHED WHITE  
GLASS IN BRUSHED NICKEL.

## MINI-PENDANT

**P5139-09** Brushed Nickel

**P5139-77** Forged Bronze

Size: 4-1/2" dia., 7-1/4" ht.

Overall ht. w/stem 64"; wire 15'.

Lamp: One medium base lamp,  
100w max.



*All pendants on these pages include one  
6" stem, four 12" stems, and 6 links of  
chain, unless otherwise noted.*

## Merge

OPAL GLASS SHADE WITH  
IRON ELEMENTS.



### MINI-PENDANT

**P5055-20** Antique Bronze  
Size: 5-1/4" dia., 9-1/4" ht.  
Overall ht. w/stem 75"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

## Orbitz

ETCHED OPAL GLASS WITH  
BRUSHED NICKEL OR ANTIQUE  
BRONZE FINISH.

### MINI-PENDANT

**P5114-09** Brushed Nickel  
**P5114-20** Antique Bronze  
Size: 4" dia., 7-3/4" ht. Overall ht.  
w/chain or stem 73"; wire 120".  
Lamp: One medium base lamp,  
100w max.



## Revive

ETCHED FLUTED GLASS.

### MINI-PENDANT

**P5148-09** Brushed Nickel  
**P5148-20** Antique Bronze  
Size: 4" dia., 8" ht. Overall ht.  
w/stem 76"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Invite

DUAL LAYER ETCHED GLASS SURROUNDED  
BY A SILK MYLAR DRUM SHADE.



*Shown P5110-09 mini-pendants*

# Calven

BRUSHED NICKEL FINISH WITH ETCHED WHITE GLASS.  
FORGED BLACK FINISH WITH LINEN SHADE.

**MINI-PENDANT**  
**P5118-09WB** Brushed Nickel  
 Etched opal glass.  
 Size: 6-3/8" dia., 10-3/4" ht. Overall  
 ht. w/stem 75"; wire 120".  
 Lamp: One G9 base halogen lamp,  
 60w max. included.

**MINI-PENDANT**  
**P5118-80WB** Forged Black  
 Opal linen shade.  
 Size: 6-3/8" dia., 10-5/8" ht.  
 Overall ht. w/stem 77"; wire 10'.  
 Lamp: One G9 base halogen  
 lamp, 60w max., included



*All pendants on these pages include two  
6" stems, one 12" stem and one 15" stem  
with 90° swivel, unless otherwise noted.*



# Wisten

BRUSHED NICKEL AND ANTIQUE  
BRONZE FINISHES WITH TRIPLE  
ETCHED GLASS.



P5108-09  
P5108-09EBWB



P5108-20  
P5108-20EBWB



## MINI-PENDANT

**P5108-09** Brushed Nickel  
**P5108-20** Antique Bronze  
Size: 4" dia., 6-3/4" ht. Overall ht.  
w/stem 120"; wire 15'.  
Lamp: One medium base lamp,  
100w max.

## CFL MINI-PENDANT

**P5108-09EBWB** Brushed Nickel  
**P5108-20EBWB** Antique Bronze  
Size: 4" dia., 6-3/4" ht. Overall ht.  
w/stem 120"; wire 15'.  
Lamp: One 13w GU24 CFL lamp  
included.



## PENDANT

**P5112-09** Brushed Nickel  
**P5112-20** Antique Bronze  
Size: 17" dia., 21-1/8" ht.  
Overall ht. w/chain 96"; wire 15'.  
Lamp: One medium base lamp,  
150w max.

P5112-09



P5112-20



## MINI-PENDANT

**P5167-09** Brushed Nickel  
**P5167-20** Antique Bronze  
Size: 3-3/4" dia., 9-3/4" ht.  
Overall ht. w/stem 67"; wire 10'.  
Lamp: One medium base lamp,  
100w max.  
Socket tool included.

P5167-20



P5167-09



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.

# Archie

WELCOME GUESTS WITH AESTHETIC AUTHENTICITY.  
FINELY CRAFTED STRAP AND KNOB DETAILS WITH  
DOUBLE PRISMATIC GLASS.



Shown: P5026-74 pendants.

## PENDANT

**P5026-15** Polished Chrome

**P5026-74** Venetian Bronze

**P5026-81** Antique Nickel

Size: 10-1/2" dia., 9-1/4" ht.

Overall ht. w/stem 75"; wire 10'.

Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5173-15** Polished Chrome

**P5173-74** Venetian Bronze

**P5173-81** Antique Nickel

Size: 5-3/4" dia., 8-3/4" ht.

Overall ht. w/stem 75"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*Includes two 6" stems, one  
12" stem, two 15" stems and  
6 links of chain.*



P5026-81



P5026-74



P5026-15



P5173-74



P5173-81



P5173-15

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Archive

ANTIQUE BRONZE WITH SATIN BRASS  
ACCENTS AND ANTIQUE NICKEL WITH  
BRUSHED NICKEL ACCENTS.

## PENDANT

**P5124-20** Antique Bronze

**P5124-81** Antique Nickel

Size: 16" dia., 6-1/8" ht.

Overall ht. w/cord 117"; wire 10'.

Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5161-20** Antique Bronze

**P5161-81** Antique Nickel

Size: 9" dia., 5-1/8" ht.

Overall ht. w/cord 116"; wire 10'.

Lamp: One medium base  
lamp, 100w max.



# Penn

MODERN TAKE ON VINTAGE ELECTRIC  
DESIGN WITH CLEAR GLASS SPHERE.

## PENDANT

**P5067-104** Polished Nickel

**P5067-137** Natural Brass

Size: 6-7/8" dia., 9-1/2" ht.

Overall ht. w/stem 76"; wire 15'.

Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5070-104** Polished Nickel

**P5070-137** Natural Brass

Size: 9-3/4" dia., 12-3/4" ht.

Overall ht. w/stem 79"; wire 15'.

Lamp: One medium base lamp,  
100w max.

*Includes one 6" stem, four  
12" stems and 6 links of chain.*



# Fresnel Lens

INDUSTRIAL ROOTS IN FORM AND FUNCTION.  
ANTIQUE-INSPIRED FRESNEL GLASS LENS IN  
BRUSHED NICKEL OR OIL RUBBED BRONZE.  
LED OPTIONS ARE 3000K, 90+ CRI.



Shown: P5197-09 pendants.

## MINI-PENDANT

**P5050-09** Brushed Nickel  
**P5050-108** Oil Rubbed Bronze  
Size: 6-1/8" dia., 6-1/4" ht.  
Overall ht. w/stem 72-1/4";  
wire 10'.  
Lamp: One medium base  
lamp, 40w max.

## LED MINI-PENDANT

**P5050-0930K9** Brushed Nickel  
**P5050-10830K9** Oil Rubbed Bronze  
Size: 6-1/8" dia., 6-1/4" ht.  
Overall ht. w/stem 72-1/4"; wire 10'.  
Lamp: One 9w LED module included.



## PENDANT

**P5188-09** Brushed Nickel  
**P5188-108** Oil Rubbed Bronze  
Size: 12-1/8" dia., 10-1/2" ht.  
Overall ht. w/stem 77"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

## LED PENDANT

**P5188-0930K9** Brushed Nickel  
**P5188-10830K9** Oil Rubbed Bronze  
Size: 12-1/8" dia., 10-1/2" ht.  
Overall ht. w/stem 77"; wire 10'.  
Lamp: One 17w LED module included.



## PENDANT

**P5197-09** Brushed Nickel  
**P5197-108** Oil Rubbed Bronze  
Size: 16" dia., 13-1/4" ht.  
Overall ht. w/stem 79";  
wire 10'.  
Lamp: One medium base lamp,  
100w max.

## LED PENDANT

**P5197-0930K9** Brushed Nickel  
**P5197-10830K9** Oil Rubbed Bronze  
Size: 16" dia., 13-1/4" ht.  
Overall ht. w/stem 79";  
wire 10'.  
Lamp: One 17w LED module included.




All pendants on these pages include two  
6" stems, one 12" stem, one 15" stem and  
6 links of chain.



# Brookside

INSPIRED BY VINTAGE LIGHT FIXTURES FOUND IN EARLY 20TH CENTURY TRAIN STATIONS. METAL SHADE AND DOUBLE PRISMATIC GLASS OPTIONS. LED OPTIONS ARE 3000K, 90+ CRI.

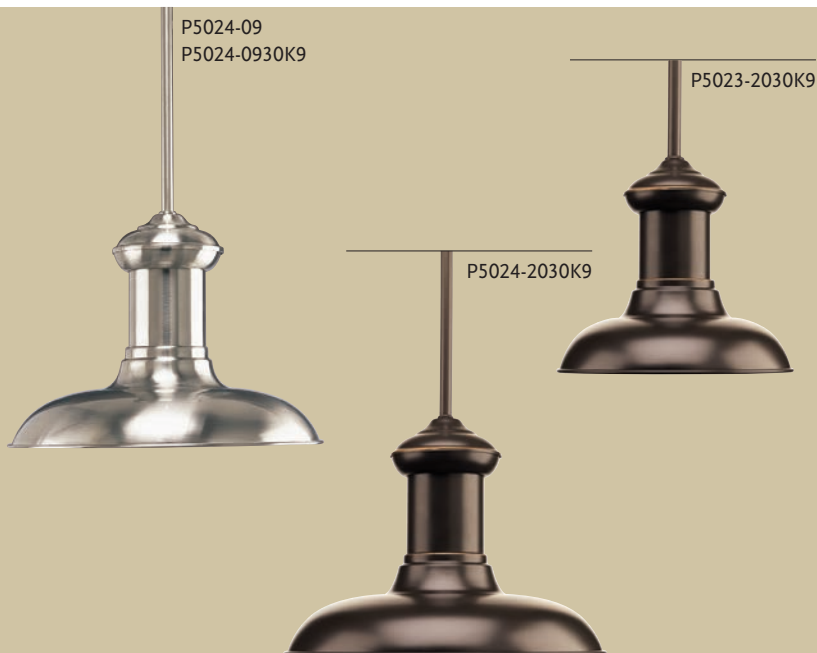

Shown: 5024-09 pendants.

## MINI-PENDANT

**P5023-09** Brushed Nickel  
Size: 8" dia., 7-1/2" ht.  
Overall ht. w/stem 64"; wire 15'.  
Lamp: One medium base lamp, 100w max.

## LED MINI-PENDANT

**P5023-0930K9** Brushed Nickel  
**P5023-2030K9** Antique Bronze  
Size: 8" dia., 7-1/2" ht.  
Overall ht. w/stem 64"; wire 15'.  
Lamp: One 17w LED module included.

## PENDANT

**P5024-09** Brushed Nickel  
Size: 12" dia., 9-1/8" ht.  
Overall ht. w/stem 65"; wire 15'.  
Lamp: One medium base lamp, 150w max.



## LED PENDANT

**P5024-0930K9** Brushed Nickel  
**P5024-2030K9** Antique Bronze  
Size: 12" dia., 9-1/8" ht.  
Overall ht. w/stem 65"; wire 15'.  
Lamp: One 17w LED module included.



## PENDANT

**P5181-09** Brushed Nickel  
**P5181-20** Antique Bronze  
Prismatic glass  
Size: 12" dia., 9-1/8" ht.  
Overall ht. w/stem 65"; wire 15'.  
Lamp: One medium base lamp, 100w max.

PROGRESS **LED**



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.



# Academy

PENDANTS WITH CLASSIC STYLING FEATURE CLEAR SEEDED GLASS WITH POLISHED CHROME OR CLEAR LIGHT UMBER GLASS WITH ANTIQUE BRONZE.



## MINI-PENDANT

**P5097-15** Polished Chrome

**P5097-20** Antique Bronze

Size: 5-3/8" dia., 7" ht. Overall ht. w/stem 73"; wire 10'.

Lamp: One G9 base halogen lamp, 35w max.

## ONE-LIGHT PENDANT

**P5137-15** Polished Chrome

**P5137-20** Antique Bronze

Size: 8" dia., 9" ht. Overall ht. w/stem 75"; wire 10'.

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT PENDANT

**P5138-15** Polished Chrome

**P5138-20** Antique Bronze

Size: 12" dia., 12-3/4" ht. Overall ht. w/stem 79"; wire 10'.

Lamp: One medium base lamp, 100w max.

*All fixtures on this page include two 6" stems, one 12" stem, two 15" stems and 6 links of chain.*





P5163-09

## Prismatic Glass

INDUSTRIAL STYLE METAL FRAMES SUPPORT  
CLEAR PRISMATIC GLASS.



P5182-09



P5183-09



### MINI-PENDANT

**P5163-09** Brushed Nickel  
Size: 9" dia., 8-1/4" ht.  
Overall ht. w/stem 50"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.

### PENDANT

**P5182-09** Brushed Nickel  
Size: 12-5/8" dia., 11" ht. Overall  
ht. w/stem 53"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.

### PENDANT

**P5183-09** Brushed Nickel  
Size: 16" dia., 13-1/2" ht. Overall  
ht. w/stem 56"; wire 10'.  
Lamp: One medium base  
lamp, 150w max.

*Shown: P5183-09 pendants.*

*All fixtures on this page include  
two 6" stems, one 12" stem and  
one 15" stem and a 90° swivel.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# LED Pendants

RETRO STYLE LED PENDANT WITH  
PRISMATIC GLASS, 3000K, 90+ CRI.



P5053-0930K9

## PENDANT

**P5053-0930K9** Brushed Nickel

**P5053-1530K9** Polished Chrome

**P5053-7430K9** Venetian Bronze

Size: 14-5/8" dia., 6-5/8" ht. Overall ht. w/stem 73"; wire 15'.

Lamp: One 17w LED module included.



*Includes one 6" stem, four 12" stems and 6 links of chain.*



*Shown: P5003-09 mini-pendants.*



P5053-7430K9



P5053-1530K9



P5003-09

# Modern Glass

ETCHED GLASS DIFFUSER WITH  
CLEAR GLASS ACCENTS.



P5011-09



P5012-09

## MINI-PENDANT

**P5003-09** Brushed Nickel

Size: 12-1/4" dia., 7-1/8" ht.

Overall ht. w/stem 73"; wire 15'.

Lamp: One medium base lamp, 100w max.

## MINI-PENDANT

**P5011-09** Brushed Nickel

Canopy adjusts to 45° for slope ceiling installation.

Size: 12" dia., 7-1/2" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp, 100w max.

## PENDANT

**P5012-09** Brushed Nickel

Canopy adjusts to 45° for slope ceiling installation.

Size: 20" dia., 7-1/2" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp, 100w max.

*All fixtures on this page include two 12" stems and two 15" stems with 90° swivel, unless otherwise noted.*

# Kiss

THIS FUN, FLIRTY FIXTURE GIVES YOU A KISS OF LIGHT, IDEAL FOR A VARIETY OF INTERIORS.

## MINI-PENDANT

**P5186-104WB** Polished Nickel

**P5186-108WB** Oil Rubbed Bronze

Size: 5-1/8" dia., 5-7/8" ht.

Overall ht. w/stem 72"; wire 10'.

Lamp: One GU10 halogen lamp, 50w max., included.

## MINI-PENDANT

**P5187-104** Polished Nickel

**P5187-108** Oil Rubbed Bronze

Size: 10-1/8" dia., 10-3/4" ht.

Overall ht. w/stem 77"; wire 10'.

Lamp: One medium base lamp, 100w max.



*Includes one 6" stem, four 12" stems and 6 links of chain.*



*Shown: P5186-104WB mini-pendants.*

# Double Glass

THIN LINEAR DETAILS GIVE A SLEEK PROFILE TO THE UMBER SHADE SURROUNDED BY CLEAR GLASS.

## MINI-PENDANT

**P5177-108** Oil Rubbed Bronze

Size: 9-1/2" dia., 7-1/4" ht.

Overall ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp, 100w max.

*Includes two 6" stems, one 12" stem, and two 15" stems and 6 links of chain.*

*See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.*





# Madison

SIMPLE, ELEGANT ILLUMINATION  
WITH CHARMING HIGHLIGHTS.  
ETCHED GLASS WITH SOFT CURVES.



P5079-09



P5079-20



P5078-20

## MINI-PENDANT

**P5078-09** Brushed Nickel

**P5078-20** Antique Bronze

Size: 7-1/2" dia., 8" ht.

Overall ht. w/stem 52"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*Includes one 9" stem, and three  
12" stems with 90° swivel.*

## PENDANT

**P5079-09** Brushed Nickel

**P5079-20** Antique Bronze

Size: 15-3/4" dia., 8-3/4" ht.

Overall ht. w/stem 66"; wire 10'.

Lamp: One medium base lamp,  
150w max.

*Includes one 6" stem, and three  
12" stems with 90° swivel.*



P5078-09

P5135-09



P5135-74



# North Park

SQUARE ETCHED GLASS.

## MINI-PENDANT

**P5135-09** Brushed Nickel

**P5135-74** Venetian Bronze

Size: 5-1/2" sq., 7-1/8" ht.

Overall ht. w/stem 64-1/8";

wire 15'.

Lamp: One medium base  
lamp, 100w max.



# Alexa

ETCHED LINEN GLASS WITH A  
CLEAR ACCENT STRIP.

**P5147-09** Brushed Nickel  
Size: 4" dia., 7-5/8" ht.  
Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



# Clear Glass

HAND BLOWN CLEAR GLASS SHADE  
EXPOSES A HINT OF POLISHED NICKEL.

MINI-PENDANT  
**P5184-104** Polished Nickel  
Size: 8-3/4" dia., 9" ht.;  
Overall ht. w/stem 52";  
wire 10'.  
Lamp: One medium base  
lamp, 100w max.

*Includes one 6" stem, four 12" stems  
and 6 links of chain.*



*Shown: P5184-104 pendants.*

# Etched and Clear Glass

CLEAR GLASS WITH ETCHED LINEAR  
PATTERN AND BRUSHED NICKEL FINISH.

**P5158-09** Brushed Nickel  
Size: 3-7/8" dia., 7-1/4" ht.  
Overall ht. w/stem 49"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.



*All pendants on this spread include two 6"  
stems, one 12" stem, two 15" stems and  
90° hang straight, unless otherwise noted.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Joy

ANTIQUE BRONZE WITH ETCHED LIGHT  
UMBER GLASS OR BRUSHED NICKEL  
WITH WHITE ETCHED GLASS.



## MINI-PENDANT

**P5270-09** Brushed Nickel

**P5270-20** Antique Bronze

Size: 6" dia., 7" ht. Overall ht.

w/chain or stem 94"; wire 10'.

Lamp: One medium base lamp,  
100w max.

# Bravo

BRUSHED NICKEL FINISH WITH ETCHED  
GLASS OR ANTIQUE BRONZE FINISH WITH  
UMBER LINEN GLASS.

## MINI-PENDANT

**P5300-09** Brushed Nickel

**P5300-20** Antique Bronze

Size: 7-1/4" dia., 6-1/2" ht.

Overall ht. w/chain or stem 94";

wire 10'.

Lamp: One medium base lamp,  
100w max.



## MINI-PENDANT

**P5300-09WB** Brushed Nickel

Size: 7-1/4" dia., 6-1/2" ht.

Overall ht. w/chain or stem 94";

wire 10'.

Lamp: One 13w GU24 CFL lamp  
included.



*Bravo has two 12" stems and 72" chain.*

SOFT ETCHED GLASS STEM-HUNG PENDANT  
COORDINATES WITH JOY, BRAVO AND MANY  
OTHER FAMILIES.

## ONE-LIGHT PENDANT

**P5193-09** Brushed Nickel

**P5193-20ETUM** Antique Bronze  
with etched umber glass

**P5193-20EUL** Antique Bronze  
with etched umber linen glass

Size: 19-1/2" dia. 8-5/8" ht.

Overall ht. w/chain 95"; wire 10".

Lamp: One medium base lamp,  
100w max.



*All fixtures on this page include two 6" stems,  
and 72" chain, unless otherwise noted.*

# Savannah

ANTIQUÉ ALABASTER GLASS.



## MINI-PENDANT

**P5040-42** Seabrook

**P5040-86** Burnished Chestnut

Size: 8-3/4" dia., 6-3/4" ht.,  
Overall ht. w/stem 63"; wire 15'.  
Lamp: One medium base lamp,  
100w max.

# Avalon

ETCHED ALABASTER STYLE GLASS.

## MINI-PENDANT

**P5068-09** Brushed Nickel

**P5068-20** Antique Bronze

Size: 7-3/4" dia., 6-1/4" ht.

Overall ht. w/stem 63"; wire 15'.

Lamp: One medium base lamp,  
100w max.

## MINI-PENDANT

**P5145-09EBWB** Brushed Nickel

**P5145-20EBWB** Antique Bronze

Size: 7-3/4" dia., 6-1/2" ht.

Overall ht. w/stem 63"; wire 10'.

Lamp: One 13w GU24 CFL lamp  
included.



# Spirit

LIGHT UMBER ETCHED GLASS SHADES.

## MINI-PENDANT

**P5160-20** Antique Bronze

**P5160-144** Pebbles

Size: 7-1/8" dia., 6-3/4" ht. Overall

ht. w/stem 73"; wire 10'.

Lamp: One medium base lamp,  
100w max.

*Includes one 6" stem, four 12" stems  
and 6 links of chain.*



*All pendants on this page include two  
12" stems, two 15" stems with 90° hang  
straight, unless otherwise noted.*

*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Pavilion

CREATE A PLAYFUL MOOD WITH  
SUBTLE UNDERTONES.  
ETCHED WATERMARK GLASS.



## PENDANT

**P5084-09** Brushed Nickel  
**P5084-20** Antique Bronze  
Size: 20-1/4" dia., 10-5/8" ht. Overall ht. w/chain 86"; wire 15'.  
Lamp: One medium base lamp, 150w max.

## MINI-PENDANT

**P5125-09** Brushed Nickel  
**P5125-20** Antique Bronze  
Size: 9-7/8" dia., 6-1/4" ht. Overall ht. w/stem 63"; wire 10'.  
Lamp: One medium base lamp, 100w max.



# Inspire

OFF-WHITE LINEN DRUM SHADES.

## MINI-PENDANT

**P5065-09** Brushed Nickel  
**P5065-20** Antique Bronze  
Size: 6-1/2" dia., 6-1/4" ht. Overall ht. w/chain or stem 93"; wire 120".  
Lamp: One medium base lamp, 100w max.

*Includes two 6" stems and 72" chain.*

*All stem hung fixtures on these pages include two 12" stems, two 15" stems with 90° hang straight, unless otherwise noted.*

# Trinity

ETCHED GLASS SHADE.



## PENDANT

**P5095-09** Brushed Nickel  
**P5095-20** Antique Bronze  
 Size: 18" dia., 9-1/2" ht.  
 Overall ht. w/chain 85"; wire 15'.  
 Lamp: One medium base lamp, 150w max.

## PENDANT

**P5095-09EBWB** Brushed Nickel  
**P5095-20EBWB** Antique Bronze  
 Size: 18" dia., 9-1/2" ht.  
 Overall ht. w/chain 85"; wire 15'.  
 Lamp: One 13w GU24 CFL lamp, included.



## MINI-PENDANT

**P5096-09** Brushed Nickel  
**P5096-20** Antique Bronze  
 Size: 6-1/2" dia., 7" ht.  
 Overall ht. w/stem 64"; wire 10'.  
 Lamp: One medium base lamp, 100w max.

## MINI-PENDANT

**P5096-09EBWB** Brushed Nickel  
**P5096-20EBWB** Antique Bronze  
 Size: 6-1/2" dia., 7" ht.  
 Overall ht. w/stem 64"; wire 10'.  
 Lamp: One 13w GU24 CFL lamp, included.



See pages 298-301 for accessories, including additional chain and stems, stem kits, shades and more.

# Heart

ETCHED GLASS SHADE.

## MINI-PENDANT

**P5131-09** Brushed Nickel  
**P5131-20** Antique Bronze  
 Can be chain or stem hung.  
 Size: 6" dia., 6" ht. Overall ht. w/chain or stem 63"; wire 96".  
 Lamp: One medium base lamp, 100w max.

Includes two 6" stems and 42" chain.



# Opal Globes

OPAL GLASS GLOBES. WHITE CORD, CANOPY AND CAP.

Product No.	Size	Lamp
P4401-29	8" dia. Overall ht. w/cord 48".	1 medium base, 60w max.
P4402-29	10" dia. Overall ht. w/cord 50".	1 medium base, 100w max.
P4403-29	12" dia. Overall ht. w/cord 52".	1 medium base, 150w max.
P4406-29	14" dia. Overall ht. w/cord 54".	1 medium base, 150w max.



# Etched Glass

SOFT ETCHED GLASS TOPPED WITH BRUSHED NICKEL ORB.

MINI-PENDANT  
P5042-09 Brushed Nickel  
Size: 6" dia., 8" ht.  
Overall ht. w/stem 64"; wire 10'.  
Lamp: One medium base lamp, 100w max.

*Includes two 12" stems, and two 15" stems with 90° swivel*



# Gather

ETCHED GLASS SHADE.

## MINI-PENDANT

**P5113-09** Brushed Nickel

**P5113-20** Antique Bronze

Size: 4" dia., 5-3/4" ht. Overall

ht. w/chain/stem 63"; wire 96".  
Lamp: One medium base lamp,  
100w max.

## CFL MINI-PENDANT

**P5113-09EBWB** Brushed Nickel

**P5113-20EBWB** Antique Bronze

Size: 4" dia., 5-3/4" ht. Overall ht.

w/chain/stem 63"; wire 96".  
Lamp: One 13w GU24 CFL lamp,  
included.



*Includes two 6" stems and 42" chain.*



# Rave

ETCHED OPAL GLASS SHADES.

## MINI-PENDANT

**P5128-09WB** Brushed Nickel

Size: 7" dia., 10-3/4" ht. Overall ht.

w/chain or stem 76"; wire 120".  
Lamp: One candelabra base krypton  
lamp, 60w max. included

*Includes one 6" stem, four 12" stems  
and 6 links of chain.*



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Schoolhouse

OPAL GLASS GIVES A HINT OF NOSTALGIA TO ANY DECOR.

## PENDANT

**P5195-09** Brushed Nickel

**P5195-124** Copper Bronze

Size: 12" dia., 12-3/4" ht.

Overall ht. w/stem 79"; wire 10'.

Lamp: One medium base lamp, 100w max.

## MINI-PENDANT

**P5196-09** Brushed Nickel

**P5196-124** Copper Bronze

Size: 8" dia., 9" ht. Overall ht. w/ stem 75"; wire 10'.

Lamp: One medium base lamp, 100w max.

*Includes two 6" stems, one 12" stem, two 15" stems and 6 links of chain.*



# Format

OVAL ETCHED GLASS SHADE WITH A GRID OVERLAY. CAN BE USED WITHIN INTERIOR OR EXTERIOR SETTINGS.

## MINI-PENDANT

**P6528-31** Black

One-light hanging lantern.

Size: 5-7/8" W., 3-7/8" L., 7-3/8" ht. Overall ht. w/chain 72-5/8"; wire 15'.

Lamp: One medium base lamp, 100w max.

*Includes one 6" stem, four 12" stems and 6 links of chain.*

## ONE-LIGHT PENDANT

**P6514-31** Black

One-light hanging lantern.

Size: 9-1/2" W., 6-1/4" L., 14-3/4" ht. Overall ht. w/ chain 80-3/4"; wire 15'.

Lamp: One medium base lamp, 100w max.



# Regatta

EXTERIOR CLEAR SEEDED GLASS WITH  
ETCHED OPAL GLASS INNER DIFFUSER.

## PENDANT

**P6505-20** Antique Bronze  
Size: 9-1/2" dia., 15-1/2" ht.  
Overall ht. w/chain 87";  
wire 120".  
Lamp: One medium base  
lamp, 100w max.



# Bedford

CURVES ACCENTUATED BY ETCHED  
ALABASTER GLASS.

## PENDANT

**P5090-09** Brushed Nickel  
**P5090-20** Antique Bronze  
Size: 15-5/8" dia., 11-1/4" ht.,  
Overall ht. w/chain 50"; wire 15'.  
Lamp: One medium base lamp,  
150w max.



*See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.*

# Warehouse Pendant

SMOOTH CORD HUNG METAL SHADE  
WITH WHITE INNER-LINING

## MINI-PENDANT

**P5087-09** Brushed Nickel  
Cord-hung pendant with white  
inner-lined metal shade.  
Size: 10-1/8" dia., 6-1/2" ht.;  
cord 10'.  
Lamp: One medium base  
lamp, 100w max

## PENDANT

**P5094-09** Brushed Nickel  
**P5094-30** White  
**P5094-45** Dark Green  
**P5094-74** Venetian Bronze  
Cord hung. White inner-lined  
metal shade.  
Size: 16" dia., 7-1/2" ht. Overall  
ht. w/cord 129"; wire 10'.  
Lamp: One medium base lamp,  
150w max.

## LED MINI-PENDANT

**P5087-0930K9** Brushed Nickel  
Cord-hung pendant with white  
inner-lined metal shade.  
Size: 10-1/8" dia., 6-1/2" ht.;  
cord 10'.  
Lamp: One 17w LED module  
included.



## LED PENDANT

**P5094-0930K9** Brushed Nickel  
**P5094-3030K9** White  
**P5094-4530K9** Dark Green  
**P5094-7430K9** Venetian Bronze  
Cord hung. White inner-lined  
metal shade.  
Size: 16" dia., 7-1/2" ht. Overall  
ht. w/cord 129"; wire 10'.  
Lamp: One 17w LED module  
included.



P5094-45  
P5094-4530K9



P5094-74  
P5094-7430K9

PROGRESS **LED**



P5087-09  
P5087-0930K9



P5094-09  
P5094-0930K9



See pages 298-301 for accessories,  
including additional chain and  
stems, stem kits, shades and more.



# Prismatic Glass Domes

DOME-SHAPED CLEAR PRISMATIC  
GLASS FINISHED WITH A FRAMED EDGE



P5080-09



P5103-09

## MINI-PENDANT

**P5080-09** Brushed Nickel  
Size: 6-3/4" dia., 7" ht.  
Overall ht. w/chain 42"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

## PENDANT

**P5103-09** Brushed Nickel  
Size: 15-1/4" dia., 11" ht.  
Overall ht. w/chain 71"; wire 13'.  
Lamp: One medium base lamp,  
150w max.

# Alabaster Glass

SCROLLING DETAILS ACCENTUATE  
SOFT CURVES

## PENDANT

**P5091-09** Brushed Nickel w/  
alabaster glass  
Size: 15-3/8" dia., 16-1/2" ht.  
Overall ht. w/chain 56"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



P5091-09

# Satin Opal Glass

SATIN OPAL GLASS WITH BRUSHED  
NICKEL TRIM

## PENDANT

**P5013-09** Brushed Nickel  
Size: 16-5/8" dia., 8-7/8" ht.  
Overall ht. w/chain 46"; wire 10'.  
Lamp: One medium base lamp,  
100w max.



P5013-09

# Shades

THE OPTIONAL SHADES ARE AVAILABLE FOR USE WITH CANDELABRA-BASED FIXTURES. BENT TIP LAMPS NOT RECOMMENDED.



**P8632-01** Creme  
Brussels Linen  
Spring clip.  
Size: 3" top, 5"  
bottom, 5" ht.



**P8639-01** Beige Pleated  
Spring clip.  
Size: 3" top, 6" bottom,  
4-1/4" ht.



**P8640-01** Parchment  
Kraft Paper  
Spring clip.  
Size: 3" top, 6"  
bottom, 4-1/4" ht.



**P8701-01** Black Paper  
with silver lining  
1" candle fitter.  
Size: 5-1/2" top, 6"  
bottom, 4-3/4" ht.  
Shown on Roxbury.



**P8702-01** Blue/Green  
Fabric  
1" candle fitter.  
Size: 5-1/2" top, 6"  
bottom, 4-3/4" ht.  
Shown on Roxbury.



**P8703-01** Red Fabric  
1" candle fitter.  
Size: 5-1/2" top, 6"  
bottom, 4-3/4" ht.  
Shown on Roxbury.



**P8704-01** Off-White  
Fabric  
1" candle fitter.  
Size: 5-1/2" top, 6"  
bottom, 4-3/4" ht.  
Shown on Roxbury and  
Nissé.



**P8719-01** Sheer Black  
Chiffon  
7/8" candle fitter.  
Size: 4-1/2" dia., 5" ht.  
Shown on Noir.



**P8769-01** Pleated  
Creme Chiffon  
Spring clip.  
Size: 4-7/8" dia.,  
5" ht.



**P8772-01** Sheer Black  
Chiffon  
Slotted slip on fitter.  
Size: 18" dia.,  
8-1/2" ht.  
Shown on Noir.



**P8788-10** Polished  
Solid Brass  
Optional polished  
solid brass  
Candle-cap accessory.  
Size: 7/8" dia.,  
3/4" ht.



**P8926-01**  
Off-White Linen  
Fabric  
Spring clip.  
Size: 5-1/2" dia.,  
4-3/4" ht.  
Shown on Inspire.



**P8930-01**  
Summer White  
Fabric  
Spring clip.  
Size: 5" dia., 4-1/2" ht.  
Shown on Identity.



**P8931-01**  
Summer Linen  
Fabric  
Spring clip.  
Size: 5" dia., 4-1/2" ht.  
Shown on Identity.



## Chain

### 6 GAUGE CHAIN



P8759-81

10 feet of 6 gauge chain permits installation large chain-hung fixtures on high ceilings.  
Maximum fixture weight – 120 lbs.

- P8759-72** Cognac
- P8759-77** Forged Bronze
- P8759-80** Forged Black
- P8759-81** Antique Nickel
- P8759-84** Espresso
- P8759-86** Burnished Chestnut
- P8759-101** Classic Silver
- P8759-102** Roasted Java
- P8759-104** Polished Nickel

*Shown: P3576-09 Chandelier with P2050-09 in our Dazzle Collection.*

### 9-GAUGE CHAIN



P8757-84

10 feet of 9 gauge chain permits installation of large chain-hung fixtures on high ceilings.  
Maximum fixture weight – 50 lbs.

### ARTS & CRAFTS



10 feet of 9 gauge Arts and Crafts chain permits installation of chain-hung fixtures on high ceilings.

- P8755-46** Weathered Bronze

- |                                  |                                    |
|----------------------------------|------------------------------------|
| <b>P8757-09</b> Brushed Nickel   | <b>P8757-81</b> Antique Nickel     |
| <b>P8757-10</b> Polished Brass   | <b>P8757-84</b> Espresso           |
| <b>P8757-11</b> Antique Brass    | <b>P8757-86</b> Burnished Chestnut |
| <b>P8757-15</b> Polished Chrome  | <b>P8757-88</b> Heirloom           |
| <b>P8757-20</b> Antique Bronze   | <b>P8757-101</b> Classic Silver    |
| <b>P8757-30</b> Textured White   | <b>P8757-102</b> Roasted Java      |
| <b>P8757-31</b> Textured Black   | <b>P8757-104</b> Polished Nickel   |
| <b>P8757-42</b> Seabrook         | <b>P8757-108</b> Oil Rubbed Bronze |
| <b>P8757-46</b> Weathered Bronze | <b>P8757-124</b> Copper Bronze     |
| <b>P8757-71</b> Gilded Iron      | <b>P8757-126</b> Burnished Silver  |
| <b>P8757-72</b> Cognac           | <b>P8757-134</b> Silver Ridge      |
| <b>P8757-74</b> Venetian Bronze  | <b>P8757-137</b> Natural Brass     |
| <b>P8757-77</b> Forged Bronze    | <b>P8757-144</b> Pebbles           |
| <b>P8757-80</b> Forged Black     |                                    |

*All items on this spread not UL listed.*

# Pendant and Mini-Pendant Accessories



Shown: P5197-108 pendants.

## Mini-Pendant Stem Extension

For mini-pendants. Contains (2) 12" and (2) 15" sections.



P8601-06



P8601-86



P8670-101

**P8601-09** Brushed Nickel  
**P8601-15** Chrome  
**P8601-20** Antique Bronze  
**P8601-31** Black  
**P8601-42** Seabrook  
**P8601-46** Weathered Bronze  
**P8601-71** Gilded Iron  
**P8601-74** Venetian Bronze  
**P8601-77** Forged Bronze  
**P8601-80** Forged Black  
**P8601-81** Antique Nickel  
**P8601-84** Espresso  
**P8601-86** Burnished Chestnut  
**P8601-88** Heirloom  
**P8601-102** Roasted Java  
**P8601-104** Polished Nickel

**P8601-108** Oil Rubbed Bronze  
**P8601-124** Copper Bronze  
**P8601-134** Silver Ridge  
**P8601-137** Natural Brass  
**P8601-144** Pebbles  
**P8601-174** Urban Bronze

**P8670-101** Classic Silver  
 Decorative stem  
 extension for use with  
 Roxbury (P5100) mini-  
 pendants. Contains (2)  
 12" and (2) 15" sections.

## Socket Collar Tool



**P8685-01** Socket collar tool  
 Size: 2-5/8" dia., 7-7/8" tall.  
 The socket collar tool provides extra leverage and eliminates a loose fit when installing glass shades. Working like a wrench, the socket collar tool extends into the shade and tightens the socket ring, securing the shade in place, and can reverse to loosen the ring to remove the shade. This accessory can be used on a variety of fixtures, including chandeliers, mini-pendants, sconces and wall brackets.







*Shown: P5187-104 pendant.*

## Cord Extender for High Ceilings



P8625-30

Provides additional length to cord-hung fixtures (only) for installations on high ceilings and in stairwells. For use with P4401, P4402, P4403, P4406, P5094, P5121, and P5108.

**P8625-30** White

**P8625-31** Black

15' cord with socket for replacement on cord-hung pendants.

## Loop and Chain Hang Kit



Converts any stem-hung pendant to sloped ceiling applications.

Kit includes (6) chain links, (2) 1/8" I.P. loops, (2) 1/8" I.P. x 9/16" nipples, (1) hex nut, (1) int. lock washer, and (1) 12" piece of fiberglass sleeving.

**P8678-09** Brushed Nickel  
**P8678-20** Antique Bronze  
**P8678-104** Polished Nickel  
**P8678-124** Copper Bronze  
 Size: 7/8" dia., 9-1/2" ht.

*All items on this spread not UL listed.*



# Dazzle

CLEAR GLASS SHADES BEDAZZLED INSIDE  
WITH GLISTENING GLASS BEADS.

## THREE-LIGHT SEMI-FLUSH

**P3572-09** Brushed Nickel  
Size: 14" dia., 12" ht. Overall ht. w/  
chain 87"; wire 15'.  
Lamp: Three medium base lamps,  
each 100w max.



P3572-09

Chandelier

pg 14



# Nissé

SILVER CHIFFON SHADE  
SURROUNDED BY CLEAR  
ACRYLIC RODS.

## FOUR-LIGHT SEMI-FLUSH\*

**P3881-104** Polished Nickel  
Chain and ceiling mounts both  
included.  
Size: 20" dia., 22-1/2" ht.  
Lamps: Four candelabra base  
lamps, each 60w max.



P3881-104

Chandelier

pg 28



# Caress

WATER GLASS SHADE WITH  
ETCHED DIFFUSER GLASS INSIDE.

## TWO-LIGHT SEMI-FLUSH

**P3434-104** Polished Nickel  
Size: 16" dia., 12" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3434-104



P5044-104WB

## ONE-LIGHT

**P5044-104WB** Polished Nickel  
Size: 6-3/8" dia., 11" ht. Overall ht  
w/chain or stem 76"; wire 180".  
Lamp: One E12 base krypton lamp,  
60w max., included.

Chandelier

pg 22



Bath & Vanity

pg 377



## Status

WHITE FABRIC SHADE WITH K9  
ACCENT AND BOTTOM DIFFUSER.

### TWO-LIGHT SEMI-FLUSH

**P3495-15** Polished Chrome

Size: 13" dia., 13-5/8" ht.

Lamps: Two medium base lamps,  
each 100w max.



P3495-15

### Chandelier

pg 18



## Roxbury

CLEAR CRYSTAL GLASS.

### THREE-LIGHT SEMI-FLUSH \*

**P2817-101** Classic Silver

Size: 16" dia., 14" ht.

Lamps: Three G16.5 candelabra  
base lamps, each 60w max.

### TWO-LIGHT

**P2819-101** Classic Silver

Size: 14-1/2" dia., 8-3/4" ht.

Lamps: Two medium base  
lamps, each 60w max.  
Damp location listed.

### Chandelier

pg 34



### Bath & Vanity

pg 38o



P2817-101



P2819-101

## Noir

CLEAR DROPS AND  
SPARKLING POLISHED  
NICKEL FINISH.

### THREE-LIGHT SEMI-FLUSH

**P3400-104** Polished Nickel

Size: 13-1/2" dia., 14-7/8" ht.

Lamps: Three candelabra base  
lamps, each 60w max.



P3400-104  
shown with optional  
shade P8772-01



P3400-104

### Chandelier

pg 40



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.

# Indulge

CLEAR GLASS SHADE WITH ETCHED GLASS  
DIFFUSER SUSPENDED INSIDE.



TWO-LIGHT SEMI-FLUSH  
**P3707-20** Antique Bronze  
Size: 15" dia., 11-1/4" ht.  
Lamps: Two medium base lamps,  
each 100w max.



P3707-20

Chandelier  
pg 46



Bath & Vanity  
pg 383



# Fortune

SIMPLE, CLEAN LINES TO COORDINATE  
WITH MANY POPULAR FAMILIES,  
INCLUDING CARESS, NISSÉ AND NOIR.

TWO-LIGHT  
**P3970-104** Polished Nickel  
Size: 13-1/4" dia., 6-3/8" ht.  
Lamps: Two medium base lamps,  
each 75w max.



P3970-104

Bath & Vanity  
pg 380



Chandelier  
pg 46



# Entice

DIAMOND PATTERNED, CLEAR  
GLASS AND A BRIGHT POLISHED  
NICKEL FINISH.

THREE-LIGHT  
**P3627-104** Polished Nickel  
Size: 14-1/2" dia., 5-7/8" ht.  
Lamps: Three medium base lamps,  
each 60w max.



P3627-104

Pendant  
pg 265



# Bay Court

ETCHED INTERIOR GLASS SURROUNDED  
BY WATER GLASS.

## ONE-LIGHT

**P3941-09** Brushed Nickel

**P3941-20** Antique Bronze

Size: 11-5/8" dia., 11" ht.

Lamp: One medium base lamp,  
100w max.

## TWO-LIGHT

**P3942-09** Brushed Nickel

**P3942-20** Antique Bronze

Size: 15" dia., 7-3/8" ht.

Lamps: Two medium base lamps,  
each 60w max.



P3941-09



P3941-20



P3942-09



P3942-20

Chandelier

pg 63



Outdoor

pg 571





# Harmony

ETCHED GLASS WITH BRUSHED NICKEL  
FINISH AND SUMMER LINEN SHADE  
WITH NATURAL BRASS FINISH.



P3529-137

THREE-LIGHT SEMI-FLUSH\*  
**P3529-137** Natural Brass  
Size: 12-1/2" dia., 10-1/4" ht.  
Lamp: Three medium base lamp,  
100w max.

THREE-LIGHT SEMI-FLUSH\*  
**P3530-137** Natural Brass  
Size: 15" dia., 10-1/2" ht.  
Lamp: Three medium base lamp,  
100w max.

THREE-LIGHT SEMI-FLUSH\*  
**P3531-137** Natural Brass  
Size: 18" dia., 11-1/4" ht.  
Lamp: Three medium base lamp,  
100w max.

TWO-LIGHT SEMI-FLUSH\*  
**P3557-09** Brushed Nickel  
Size: 11-3/4" dia., 10-1/2" ht.  
Lamp: Two medium base lamp,  
100w max.

THREE-LIGHT SEMI-FLUSH\*  
**P3558-09** Brushed Nickel  
Size: 15" dia., 10-1/2" ht.  
Lamp: Three medium base lamp,  
100w max.

THREE-LIGHT SEMI-FLUSH\*  
**P3559-09** Brushed Nickel  
Size: 18" dia., 10-1/2" ht.  
Lamp: Three medium base lamp,  
100w max.



P3557-09



P3530-137



P3558-09



P3559-09



P3531-137





# Ashbury

LAYER DOUBLE DRUM LINEN SHADE.

## TWO-LIGHT SEMI-FLUSH

**P3886-134** Silver Ridge  
Size: 10" dia., 10-1/4" ht.  
Lamps: Two medium base  
lamps, each 75w max.

Bath & Vanity  
pg 381



P3886-134

Chandelier  
pg 66



# Clayton

MODERN DRUM SHADES IN CREAM  
LINEN FABRIC WITH SOFT SIDE PLEATS.

## TWO-LIGHT SEMI-FLUSH

**P3759-84** Espresso  
Bottom glass diffuser.  
Size: 13" dia., 13" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3759-84

Chandelier  
pg 74



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.

# Club

ANTIQUE BRONZE IRON SCROLLS.  
CHISELED ANGULAR PRISM AND LIGHTLY  
TEA-STAINED GLASS.

THREE-LIGHT SEMI-FLUSH\*

**P3615-20** Antique Bronze  
Size: 14" dia., 12" ht. Overall ht.  
w/stem 87"; wire 15'.  
Lamp: Three medium base  
lamps, each 100w max.



Chandelier  
pg 88



# Mingle

DECORATIVE METAL FRAME  
THAT HIGHLIGHTS CONCENTRIC  
CIRCULAR SHAPES.

TWO-LIGHT

**P3565-09** Brushed Nickel  
**P3565-20** Antique Bronze  
Size: 16" dia., 10" ht.  
Lamp: Two medium base lamp,  
100w max.



P3565-09



P3565-20

Pendants

pg 82



# Fiorentino

CLEAR SEEDED GLASS AND  
CHAMPAGNE DRIP CANDLES.

TWO-LIGHT

**P3815-77** Forged Bronze  
Size: 11-3/4" dia., 11" ht.  
Lamps: Two candelabra base  
lamps, each 60w max.



P3815-77

Chandelier  
pg 92



# Applause

TINTED PATTERNED GLASS WITH  
IRON ARMS.

## TWO-LIGHT SEMI-FLUSH

**P3507-20** Antique Bronze  
Size: 15-3/4" dia., 12" ht.  
Lamp: Two medium base lamp,  
100w max.



P3507-20

Chandelier

pg 106



# Swing

ANTIQUE BRASS WITH NATURAL  
BRASS HIGHLIGHTS AND BRONZE  
MESH SHADE

## THREE-LIGHT

**P3452-20** Antique Bronze  
Size: 15" dia., 8-1/2" ht.  
Lamps: Three medium base  
lamps, each 60w max.

Chandelier

pg 84



P3452-20



# Stroll

OFF-WHITE FABRIC SHADE WITH ETCHED  
GLASS DIFFUSER PAIRED WITH GALVANIZED  
LOOK OF THE PEBBLES FINISH.

## TWO-LIGHT\*

**P2312-144** Pebbles  
Size: 14" dia., 11-7/8" ht.  
Lamp: Two medium base lamp,  
100w max.



P2312-144

Chandelier

pg 84



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.



# Santiago

JASMINE MIST GLASS WITH SUBTLE FORGED IRON TWISTS.



P3837-102

## TWO-LIGHT

**P3837-80** Forged Black

**P3837-102** Roasted Java

Size: 14-3/8" dia., 8-1/8" ht.

Lamps: Two medium base lamps, each 75w max.



P3837-80

## THREE-LIGHT SEMI-FLUSH\*

**P3839-80** Forged Black

**P3839-102** Roasted Java

Size: 19-7/8" dia., 14-1/4" ht.

Lamps: Three medium base lamps, each 75w max.



P3839-80



P3839-102

Chandelier

pg 94



Bath & Vanity

pg 394



# Arts & Crafts

WITH A NOD TO THE BUNGALOWS OF THE 1920'S, ARTS & CRAFTS IS HIGHLIGHTED BY LIGHT HONEY ART GLASS AND GEOMETRIC PANELING.

## TWO-LIGHT

**P3513-46** Weathered Bronze

Size: 10" sq., 4-3/4" ht.

Lamps: Two medium base lamps, each 60w max.



P3513-46

Bath & Vanity

pg 401



Chandelier

pg 114



# Riverside

ETCHED LIGHT TOPAZ GLASS.

## THREE-LIGHT SEMI-FLUSH

**P3525-88** Heirloom

Size: 14" dia., 9-3/8" ht.

Lamps: Three medium base lamps, each 100w max.



P3525-88

Chandelier

pg 116



Bath & Vanity

pg 400



# Le Jardin

WEATHERED SANDSTONE GLASS  
WITH RIBBED ACCENTS.

## TWO-LIGHT SEMI-FLUSH\*

**P2841-84** Espresso

Size: 16-1/8" dia., 13-3/8" ht.

Lamps: Two medium base lamps, each 100w max.



P2841-84



P3598-84

## TWO-LIGHT

**P3598-84** Espresso

Size: 15" dia., 8" ht.

Lamps: Two medium base lamps, each 60w max.

Chandelier

pg 104



Bath & Vanity

pg 402



\* Fixture includes mounting hardware for both chain hung and ceiling mount.



# Melbourne

ETCHED WATERMARK GLASS AND SCROLLING DETAILS OFFER A HINT OF SOPHISTICATION.

## TWO-LIGHT

**P3641-84** Espresso

Size: 14-1/4" dia., 8-1/2" ht.

Lamps: Two medium base lamps, each 60w max.



P3641-84



P3718-84

## ONE-LIGHT

**P3717-84** Espresso

Size: 12" dia., 6-3/4" ht.

Lamp: One medium base lamp, 60w max.



P3717-84

## THREE-LIGHT

**P3718-84** Espresso

Size: 17" dia., 9" ht.

Lamps: Three medium base lamps, each 60w max.



P3885-84

## TWO-LIGHT SEMI-FLUSH

**P3885-84** Espresso

Size: 16-1/2" dia., 16-3/4" ht.

Lamps: Two medium base lamps, each 100w max.

## Chandelier

pg 108



## Bath & Vanity

pg 395



# Cantata

SEEDED TOPAZ GLASS ON FORGED BRONZE. ETCHED WHITE ON BRUSHED NICKEL.

## TWO-LIGHT SEMI-FLUSH \*

**P3440-09** Brushed Nickel

**P3440-77** Forged Bronze

Size: 15-3/4" dia., 10" ht.

Lamps: Two medium base lamps, each 100w max.



P3440-77



P3853-09



P3853-77

## TWO-LIGHT CLOSE-TO-CEILING

**P3853-09** Brushed Nickel

**P3853-77** Forged Bronze

Size: 15" dia., 6-7/8" ht.

Lamps: Two medium base lamps, each 75w max.



P3440-09

## Chandelier

pg 140



## Bath & Vanity

pg 404



# Kensington

FROSTED CARAMEL SWIRLED GLASS  
ON FORGED BRONZE. ETCHED WHITE  
SWIRLED GLASS ON BRUSHED NICKEL.



P3678-77



P3678-09

## ONE-LIGHT SEMI-FLUSH \*

**P3678-09** Brushed Nickel

**P3678-77** Forged Bronze

Size: 11-3/8" dia., 13" ht.

Lamp: One medium base lamp, 100w max.



P3986-77

## TWO-LIGHT SEMI-FLUSH

**P3829-09** Brushed Nickel

**P3829-77** Forged Bronze

Size: 14" dia., 12" ht.

Lamps: Two medium base lamps, each 100w max.



P3986-09

## TWO-LIGHT FLUSH

**P3986-09** Brushed Nickel

**P3986-77** Forged Bronze

Size: 14" dia., 7-3/4" ht.

Lamps: Two medium base lamps, each 60w max.



P3829-09



P3829-77

## Chandelier

pg 120



## Bath & Vanity

pg 406



# Legend

GLASS HAS NATURE INSPIRED PATTERN  
ON INSIDE WITH SMOOTH POLISHED  
FINISH OUTSIDE.

## TWO-LIGHT CLOSE-TO-CEILING

**P2315-09** Brushed Nickel

**P2315-20** Antique Bronze

Size: 14-1/2" dia., 11-3/8" ht.

Lamp: Two medium base lamp, 100w max.



P2315-09



P2315-20

## Chandelier

pg 132



\* Fixture includes mounting hardware for both chain hung and ceiling mount.

# Torino

BRUSHED NICKEL WITH ETCHED  
GLASS OR FORGED BRONZE WITH  
TEA-STAINED GLASS.



P5144-77



P3843-09



P3843-77



P5144-09



P3184-77

## TWO-LIGHT

**P3184-09** Brushed Nickel

**P3184-77** Forged Bronze

Size: 14-5/8" dia., 7-1/8" ht.

Lamps: Two medium base  
lamps, each 100w max.

## THREE-LIGHT SEMI-FLUSH \*

**P3843-09** Brushed Nickel

**P3843-77** Forged Bronze

Size: 18" dia., 18-1/2" ht. Overall  
ht. w/chain 94"; wire 15'.

Lamps: Three medium base lamps,  
each 100w max.



P3184-09

## ONE-LIGHT SEMI-FLUSH \*

**P5144-09** Brushed Nickel

**P5144-77** Forged Bronze

Size: 13-1/8" dia., 15-1/8" ht.

Overall ht. w/stem 66"; wire 10'.

Lamp: One medium base lamp,  
100w max.

## Chandelier

pg 126



## Bath & Vanity

pg 408



# Renovations

ETCHED RIBBED GLASS.

## THREE-LIGHT

**P3515-77** Forged Bronze

**P3515-81** Antique Nickel

Size: 15-5/8" dia., 10" ht.

Lamps: Three medium base lamps, each 60w max.

## THREE-LIGHT SEMI-FLUSH \*

**P3607-77** Forged Bronze

**P3607-81** Antique Nickel

Size: 15-5/8" dia., 15" ht.

Lamps: Three medium base lamps, each 60w max.

## TWO-LIGHT

**P3772-77** Forged Bronze

**P3772-81** Antique Nickel

Size: 12-3/4" dia., 6-1/2" ht.

Lamps: Two medium base lamps, each 60w max.



P3607-77



P3772-77



P3515-77



P3607-81



P3772-81

Chandelier

pg 144



Bath & Vanity

pg 389



# Victorian

OPAL GLASS ON AN OVAL FRAME.

## TWO-LIGHT OVAL

**P3326-09** Brushed Nickel

**P3326-15** Polished Chrome

**P3326-74** Venetian Bronze

Size: 16" L., 11-1/4" W., 7" ht.

Lamps: Two medium base lamps, each 60w max.



P3326-74




P3326-15



P3326-09

Bath & Vanity

pg 391

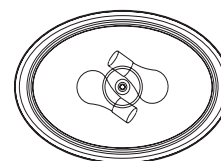

Oval Profile

\* Fixture includes mounting hardware for both chain hung and ceiling mount.



# Archie

CLEAR DOUBLE  
PRISMATIC GLASS.

## TWO-LIGHT

**P3740-15** Polished Chrome

**P3740-74** Venetian Bronze

**P3740-81** Antique Nickel

Size: 12-3/8" dia., 6-1/4" ht.

Lamps: Two medium base lamps,  
each 75w max.



P3740-74



P3740-15



P3740-81

Chandelier

pg 154



Bath & Vanity

pg 386



# Invite

ETCHED GLASS WITH MYLAR SHADE.

## TWO-LIGHT

**P3693-09** Brushed Nickel

**P3693-20** Antique Bronze

Size: 12" dia., 5-3/8" ht.

Lamps: Two medium base lamps,  
each 60w max.

## THREE-LIGHT SEMI-FLUSH\*

**P3694-09** Brushed Nickel

**P3694-20** Antique Bronze

Size: 15" dia., 5-1/4" ht. Overall ht.  
w/stem 71"; wire 12'.

Lamps: Three medium base lamps,  
each 100w max.



P3694-20



P3964-09



P3693-20



P3693-09

Bath & Vanity

pg 408



Chandelier

pg 158





# Orbitz

CIRCULAR FRAMES WITH  
ETCHED OPAL GLASS SHADES.

## THREE-LIGHT SEMI-FLUSH\*

**P3954-09** Brushed Nickel

**P3954-20** Antique Bronze

Size: 17" dia., 12 1/4" ht. Overall ht.  
w/stem 79"; wire 180".

Lamps: Three medium base lamps,  
each 100w max.

Chandelier

pg 162



Bath & Vanity

pg 424



P3954-09



P3954-20

# Bingo

ETCHED WHITE GLASS SHADES  
ARE LAYERED WITH AN  
IRONWORK PATTERN OF CIRCLES.

## TWO-LIGHT SEMI-FLUSH

**P3741-09** Brushed Nickel

**P3741-74** Venetian Bronze

Size: 14" dia., 11-7/8" ht.

Lamps: Two medium base lamps,  
each 100w max.

## TWO-LIGHT

**P2026-09WB** Brushed Nickel

**P2026-74WB** Venetian Bronze

Wall or ceiling mount.

Size: 10-1/2" L. 9" W., 4" ht.

Lamps: Two halogen G9 lamps,  
each 35w max. included.

ADA



P3741-74



P3741-09



P2026-09WB



P2026-74WB

Foyer pendant

pg 260



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.

# Lahara

TIMELESS ETCHED GLASS IS AVAILABLE  
WITH A VARIETY OF POPULAR FINISHES.

## TWO-LIGHT

**P3836-09** Brushed Nickel

**P3836-15** Polished Chrome

**P3836-74** Venetian Bronze

Size: 13" dia., 6-1/8" ht.

Lamps: Two medium base lamps,  
each 100w max.



Bath & Vanity

pg 426



P3836-09



P3836-15



P3836-74

# Addison

INSPIRED BY THE SOPHISTICATED  
SCALLOPED CUTS IN A SEASHELL.  
GLASS SHADES FEATURE A SOFT,  
ETCHED FINISH.

## TWO-LIGHT

**P3870-09** Brushed Nickel

**P3870-15** Polished Chrome

**P3870-74** Venetian Bronze

Size: 12-5/8" sq., 6-1/8" ht.

Lamps: Two medium base  
lamps, each 100w max.



Bath & Vanity

pg 428



P3870-74



P3870-09



P3870-15



# Rave

SEMI-FLUSH WITH ETCHED  
CURVED GLASS.

## TWO-LIGHT SEMI-FLUSH

**P3550-09** Brushed Nickel  
Size: 13-1/4" dia., 9-1/2" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3550-09

Chandelier  
pg 176



# Wisten

WISTEN'S TRIPLE OPAL GLASS OFFERS A  
SIMPLE, MODERN AND ELEGANT TOUCH.

## TWO-LIGHT

**P3290-09** Brushed Nickel  
**P3290-20** Antique Bronze  
Size: 14" dia., 7" ht.  
Lamps: Two medium base  
lamps, each 100w max.

## TWO-LIGHT CFL

**P3290-09EBWB** Brushed Nickel  
**P3290-20EBWB** Antique Bronze  
Size: 14" dia., 7" ht.  
Lamps: Two 13w GU24 CFL  
lamps, included.

P3290-20  
P3290-20EBWBP3290-09  
P3290-09EBWB

Chandelier  
pg 168



Bath & Vanity  
pg 422



# Calven

LINEN SHADE IN FORGED BLACK OR  
ETCHED GLASS SHADE WITH BRUSHED  
NICKEL.

## THREE-LIGHT SEMI-FLUSH \*

**P3878-80** Forged Black  
Linen Shade  
Size: 15" dia., 10-1/4" ht.  
Overall ht. w/chain 75"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.

## THREE-LIGHT SEMI-FLUSH \*

**P3878-09** Brushed Nickel  
Etched Glass Shade  
Size: 16" dia., 12" ht.  
Overall ht. w/stem 75"; wire 15'.  
Lamps: Three medium base  
lamps, each 100w max.



P3878-80



P3878-09

Chandelier  
pg 170



Bath & Vanity  
pg 423



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.

# Alexa

ETCHED LINEN GLASS WITH A  
CLEAR ACCENT STRIP.

## TWO-LIGHT SEMI-FLUSH

**P2851-09** Brushed Nickel  
Size: 12-1/4" dia., 11" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P2851-09

Chandelier  
pg 179



Bath & Vanity  
pg 422



Shown P2851-09 semi flush and P4459-09 chandelier.

# Replay

ETCHED WHITE GLASS.

## TWO-LIGHT

**P3423-31** Black  
**P3423-104** Polished Chrome  
Size: 14" dia., 5-3/4" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3423-31



P3424-31

## TWO-LIGHT SEMI-FLUSH \*

**P3424-31** Black  
**P3424-104** Polished Chrome  
Size: 14-3/4" dia., 10" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3423-104



P3424-104

Chandelier  
pg 194



# Pavilion

ETCHED WATERMARK GLASS.

## ONE-LIGHT

**P3478-09** Brushed Nickel  
**P3478-20** Antique Bronze  
 Size: 12" dia., 5-7/8" ht.  
 Lamp: One medium base lamp, 75w max.

## TWO-LIGHT

**P3479-09** Brushed Nickel  
**P3479-20** Antique Bronze  
 Size: 15" dia., 6-3/8" ht.  
 Lamps: Two medium base lamps, each 75w max.

## TWO-LIGHT SEMI-FLUSH\*

**P3738-09** Brushed Nickel  
**P3738-20** Antique Bronze  
 Size: 14-1/2" dia., 11-1/4" ht.  
 Lamps: Two medium base lamps, each 75w max.



P3738-09



P3479-09



P3738-20



P3478-20



P3479-20



P3478-09

Chandelier  
 pg 204



Bath & Vanity  
 pg 433



# Compass

ETCHED WHITE GLASS SHADE  
 WITH K9 GLASS ORB.

## TWO-LIGHT SEMI-FLUSH

**P3614-20** Antique Bronze  
 Size: 16" dia., 14" ht.  
 Lamps: Two medium base lamps, each 100w max.



P3614-20

Chandelier  
 pg 64



Bath & Vanity  
 pg 382



\* Fixture includes mounting hardware for both chain hung and ceiling mount.



# North Park

CLEAN LINEAR FORMS, TWIN  
STRUCTURAL ARCHING ARMS AND  
SQUARE ETCHED GLASS SHADES.

## TWO-LIGHT SEMI-FLUSH \*

**P3597-09** Brushed Nickel

**P3597-74** Venetian Bronze

Size: 12-3/4" sq., 13-5/8" ht.

Lamps: Two medium base  
lamps, each 100w max.

## TWO-LIGHT

**P3852-09** Brushed Nickel

**P3852-74** Venetian Bronze

Size: 15" sq., 7-1/8" ht.

Lamps: Two medium base  
lamps, each 100w max.

## ONE-LIGHT

**P3854-09** Brushed Nickel

**P3854-74** Venetian Bronze

Size: 12-1/2" sq., 6-1/8" ht.

Lamp: One medium base  
lamp, 100w max.

Chandelier

pg 198



Bath & Vanity

pg 432



P3597-74



P3597-09



P3852-09



P3852-74



P3854-09

# Glendale

WHITE ALABASTER GLASS AND  
OVAL ARMS.

## THREE-LIGHT SEMI-FLUSH \*

**P3780-09** Brushed Nickel

Size: 19" dia., 18-3/4" ht.

Lamps: Three medium base lamps,  
each 100w max.



P3780-09

Chandelier

pg 203



# Spirit

LIGHT UMBER ETCHED GLASS SHADES.

## TWO-LIGHT SEMI-FLUSH \*

**P3414-20** Antique Bronze

**P3414-144** Pebbles

Size: 13-1/8" dia., 12-1/4" ht.

Lamps: Two medium base lamps, each 100w max.

## ONE-LIGHT

**P3500-20** Antique Bronze

**P3500-144** Pebbles

Size: 10-3/4" dia., 5" ht.

Lamps: Two medium base lamps, each 60w max.

## TWO-LIGHT

**P3501-20** Antique Bronze

**P3501-144** Pebbles

Size: 12-3/4" dia., 5-1/4" ht.

Lamps: Two medium base lamps, each 60w max.

## THREE-LIGHT

**P3502-20** Antique Bronze

**P3502-144** Pebbles

Size: 14-5/8" dia., 6" ht.

Lamps: Three medium base lamps, each 60w max.

## TWO-LIGHT

**P3506-20** Antique Bronze

**P3506-144** Pebbles

Size: 15-1/8" dia., 6-7/8" ht.

Lamps: Two medium base lamps, each 75w max.



P3506-20



P3506-144



P3500-20



P3414-20



P3414-144



P3500-144



P3501-144



P3502-20



P3501-20

Bath & Vanity

pg 439



Chandelier

pg 208



# Joy/Bravo

SOFT ETCHED GLASS SHADES AND  
ACCENT KNOBS.

## TWO-LIGHT

**P3855-09** Brushed Nickel

**P3855-20** Antique Bronze

Size: 13-3/8" dia., 9-1/8" ht.

Lamps: 2 medium base, each 100w max.



P3855-09



P3855-20

Chandelier

pg 190



\* Fixture includes mounting hardware for both chain hung and ceiling mount.

# Savannah

PINEAPPLE HOSPITALITY ACCENTS AND  
ANTIQUE ALABASTER GLASS.



*Shown P3541-86 semi flush and P3204-86 wall bracket.*

## TWO-LIGHT

**P3539-42** Seabrook  
**P3539-86** Burnished Chestnut  
Size: 13" dia., 7-1/4" ht.  
Lamps: Two medium base  
lamps, each 60w max.

## THREE-LIGHT

**P3540-42** Seabrook  
**P3540-86** Burnished Chestnut  
Size: 17" dia., 8-3/4" ht.  
Lamps: Three medium base  
lamps, each 60w max.

## TWO-LIGHT SEMI-FLUSH

**P3541-42** Seabrook  
**P3541-86** Burnished Chestnut  
Size: 13-1/8" dia., 13-1/4" ht.  
Lamps: Two medium base  
lamps, each 100w max.



P3539-86



P3541-86



P3540-86



P3540-42



P3541-42



P3539-42

Chandelier  
pg 212



Bath & Vanity  
pg 437



# Madison

SOFT ETCHED GLASS AND  
KNOB ACCENTS.



P3311-09

## ONE-LIGHT

**P3311-09** Brushed Nickel

**P3311-20** Antique Bronze

Size: 12" dia., 7-1/2" ht.

Lamps: One medium base lamp, 60w max.

## TWO-LIGHT

**P3312-09** Brushed Nickel

**P3312-20** Antique Bronze

Size: 15-3/4" dia., 8-1/4" ht.

Lamps: Two medium base lamps, each 60w max.



P3312-20



P3663-20

## THREE-LIGHT SEMI-FLUSH

**P3663-09** Brushed Nickel

**P3663-20** Antique Bronze

Glass reverses up or down.

Size: 20-3/4" dia., 14" ht.

Lamps: Three medium base lamps, each 60w max.



P3663-09

Chandelier  
pg 220



Bath & Vanity  
pg 440



# Inspire

OFF-WHITE LINEN SHADE WITH  
WHITE ACRYLIC DIFFUSER.

## CFL SEMI-FLUSH

**P3939-09** Brushed Nickel

**P3939-20** Antique Bronze

White acrylic diffuser.

Size: 13" dia., 6-1/2" ht.

Lamps: Two GU24 CFL lamps, each 26w max.



P3939-20



P3939-09

Chandelier  
pg 230



Bath & Vanity  
pg 447



# Trinity

CURVED ETCHED GLASS WITH  
CIRCULAR ACCENTS.



P3475-09



P3473-20



P3477-20



P3475-20



P3476-09

## TWO-LIGHT SEMI-FLUSH\*

**P3473-09** Brushed Nickel  
**P3473-20** Antique Bronze  
Size: 16" dia., 14-3/4" ht.  
Lamps: Two medium base  
lamps, each 100w max.

## TWO-LIGHT

**P3476-09** Brushed Nickel  
**P3476-20** Antique Bronze  
Size: 15" dia., 7-1/4" ht.  
Lamps: Two medium base  
lamps, each 60w max.

## ONE-LIGHT

**P3475-09** Brushed Nickel  
**P3475-20** Antique Bronze  
Size: 12-1/2" dia., 7-3/8" ht.  
Lamp: One medium base  
lamp, 100w max.

## THREE-LIGHT

**P3477-09** Brushed Nickel  
**P3477-20** Antique Bronze  
Size: 17" dia., 8-1/4" ht.  
Lamps: Three medium base  
lamps, each 60w max.



P3473-09

## Bath & Vanity

pg 442



## Chandelier

pg 224



# Bedford

BELL-SHAPED ALABASTER GLASS  
SHADE.

## ONE-LIGHT SEMI-FLUSH \*

**P3788-09** Brushed Nickel  
**P3788-20** Antique Bronze  
Size: 10-1/2" dia., 14-1/2" ht.  
Lamp: One medium base  
lamp, 150w max.



P3788-09



P3788-20

## Chandelier

pg 244



## Bath & Vanity

pg 456



\* Fixture includes mounting hardware for  
both chain hung and ceiling mount.



# Alabaster Glass

DOME SHAPED GLASS WITH SOLID TRIM AND DECORATIVE KNOBS.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3924-09EB</b> <b>P3924-20EB</b>	Brushed Nickel Antique Bronze	One-light	11-3/8" dia., 5-1/2" ht.	1 GU24 CFL lamp 13w max.
<b>P3925-09EB</b> <b>P3925-20EB</b>	Brushed Nickel Antique Bronze	Two-light	13-1/4" dia., 5-3/4" ht.	2 GU24 CFL each 18w max.
<b>P3926-09EB</b> <b>P3926-20EB</b>	Brushed Nickel Antique Bronze	Three-light	15-1/4" dia., 6-5/8" ht.	3 GU24 CFL each 18w max.



P3925-20EB



P3925-09EB



P3926-20EB



P3926-09EB



P3924-09EB



P3924-20EB

# Avalon

SWIRLED ALABASTER STYLE GLASS WITH ROPE DETAILING.

## THREE-LIGHT SEMI-FLUSH \*

**P3467-09** Brushed Nickel  
**P3467-20** Antique Bronze  
Size: 14-1/2" dia., 14-3/8" ht.  
Lamps: Three medium base lamps, each 75w max.

## TWO-LIGHT CFL SEMI-FLUSH \*

**P3468-09EBWB** Brushed Nickel  
Size: 14-1/2" dia., 14-3/8" ht.  
Lamps: Two 13w GU24 CFL lamps, included.



P3467-09  
P3468-09EBWB

## Chandelier

pg 216



## Bath & Vanity

pg 449



## LED Flush Mounts

- 120V AC Replaceable LED module
- 1211 lumen source
- 71.2 lumens/watt
- 3000K color temperature
- TM-21 60,000 hr. life
- Dimmable to 10% with ELV type dimmers
- 90+ CRI
- CA Title 24 Compliant

### ETCHED WHITE OR UMBER GLASS

Product No.	Finish	Description	Size	Lamp(s)
P2302-0930K9 P2302-2030K9	Brushed Nickel Antique Bronze	One-light	11" dia., 4" ht.	LED, 17w
P2303-0930K9 P2303-2030K9	Brushed Nickel Antique Bronze	One-light	13-1/4" dia., 4-3/4" ht.	LED, 17w
P2321-2030K9	Antique Bronze w/ umber glass	One-light	11" dia., 4" ht.	LED, 17w
P2322-2030K9	Antique Bronze w/ umber glass	One-light	13-1/4" dia., 4-3/4" ht.	LED, 17w



P2303-2030K9



P2302-0930K9



P2302-2030K9



P2303-0930K9





P2322-2030K9



P2321-2030K9

## WHITE RIBBED GLASS

Product No.	Finish	Description	Size	Lamp(s)	
<b>P2304-0930K9</b>	Brushed Nickel	One-light	11-3/8" dia.,	LED, 17w	
<b>P2304-2030K9</b>	Antique Bronze		5-3/4" ht.		
<b>P2304-3030K9</b>	White				
<b>P2305-0930K9</b>	Brushed Nickel	One-light	13" dia.,	LED, 17w	
<b>P2305-2030K9</b>	Antique Bronze		6-3/4" ht.		
<b>P2305-3030K9</b>	White				



P2304-2030K9



P2304-3030K9



P2304-0930K9



P2305-2030K9





P2305-3030K9



P2305-0930K9

## ETCHED WHITE

Product No.	Finish	Description	Size	Lamp(s)	
<b>P2300-0930K9</b>	Brushed Nickel	One-light	11" dia.,	LED, 17w	
<b>P2300-2030K9</b>	Antique Bronze		4-1/4" ht.		
<b>P2301-0930K9</b>	Brushed Nickel	One-light	12-1/2" dia.,	LED, 17w	
<b>P2301-2030K9</b>	Antique Bronze		4-1/2" ht.		



P2300-0930K9



P2301-0930K9



P2301-2030K9



P2300-2030K9

## Ribbed Melon Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3816-09</b>	Brushed Nickel	One-light	11-3/8" dia.,	1 medium base,
<b>P3816-20</b>	Antique Bronze		6" ht.	75w max.
<b>P3816-30</b>	White			

<b>P3817-09</b>	Brushed Nickel	Two-light	13-1/4" dia.,	2 medium base,
<b>P3817-20</b>	Antique Bronze		6-1/8" ht.	each 75w max.
<b>P3817-30</b>	White			

<b>P3818-09</b>	Brushed Nickel	Three-light	15-1/4" dia.,	3 medium base,
<b>P3818-20</b>	Antique Bronze		7-1/2" ht.	each 60w max.
<b>P3818-30</b>	White			

Product No.	Finish	Description	Size	Lamp(s)
<b>P3816-09EB</b>	Brushed Nickel	One-light	11-3/8" dia.,	1 GU24 CFL
<b>P3816-20EB</b>	Antique Bronze		6" ht.	13w max.
<b>P3816-30EB</b>	White			

<b>P3817-09EB</b>	Brushed Nickel	Two-light	13-1/4" dia.,	2 GU24 CFL
<b>P3817-20EB</b>	Antique Bronze		7" ht.	each 13w max.
<b>P3817-30EB</b>	White			

<b>P3818-09EB</b>	Brushed Nickel	Three-light	15-1/4" dia.,	3 GU24 CFL
<b>P3818-20EB</b>	Antique Bronze		7-1/2" ht.	each 18w max.
<b>P3818-30EB</b>	White			



## Ribbed Melon

Product No.	Finish	Description	Size	Lamp(s)
<b>P3876-09</b>	Brushed Nickel	Two-light	13-1/4" dia.,	2 medium base,
<b>P3876-20</b>	Antique Bronze	semi-flush	12-1/2" ht.	100w max.



Close-to-ceiling



## Etched Alabaster Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3688-09</b>	Brushed Nickel	One-light	11-1/2" dia.,	1 medium base,
<b>P3688-15</b>	Polished Chrome		3-3/4" ht.	60w max.
<b>P3688-20</b>	Antique Bronze			
<b>P3688-30</b>	Textured White			
<b>P3689-09</b>	Brushed Nickel	Two-light	14" dia.,	2 medium base,
<b>P3689-15</b>	Polished Chrome		4-3/4" ht.	each 60w max.
<b>P3689-20</b>	Antique Bronze			
<b>P3689-30</b>	Textured White			
<b>P3697-09</b>	Brushed Nickel	Three-light	17-1/2" dia.,	3 medium base,
<b>P3697-20</b>	Antique Bronze		5-7/8" ht.	each 60w max.
<b>P3697-30</b>	Textured White			



## Etched Ribbed Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3761-09EBWB</b>	Brushed Nickel	One-light	11-1/2" dia.,	1 13w GU24 CFL
			4-1/2" ht.	(included)
<b>P3762-09EBWB</b>	Brushed Nickel	Two-light	14" dia.,	2 13w GU24 CFL
			4-3/4" ht.	(included)



## Etched Alabaster Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3760-09EBWB</b>	Brushed Nickel	Two-light	16-3/4" dia.,	2 18w GU24 CFL.
			5-1/2" ht.	(included)
<b>P3764-09EBWB</b>	Brushed Nickel	One-light	11-1/2" dia.,	1 13w GU24 CFL.
			3-3/4" ht.	(included)
<b>P3765-09EBWB</b>	Brushed Nickel	Two-light	14" dia.,	2 13w GU24 CFL.
			4-3/4" ht.	(included)





## Random Collection



P3687-09WB

P3687-20WB



P3998-20WB



P3999-20WB

Product No.	Finish	Description	Size	Lamp(s)
<b>P3687-09WB</b>	Brushed Nickel	One-light w/ alabaster glass	11" dia., 5-3/8" ht.	1 13w GU24 CFL (included)
<b>P3687-20WB</b>	Antique Bronze			
<b>P3997-09WB</b>	Brushed Nickel	One-light w/ etched glass	11" dia., 5-3/8" ht.	1 13w GU24 CFL (included)
<b>P3997-15WB</b>	Polished Chrome			
<b>P3997-20WB</b>	Antique Bronze			
<b>P3998-20WB</b>	Antique Bronze	One-light w/light etched umber glass	11" dia., 5-3/8" ht.	1 13w GU24 CFL (included)
<b>P3999-20WB</b>	Antique Bronze	One-light w/ etched umber linen glass	11" dia., 5-3/8" ht.	1 13w GU24 CFL (included)

Product No.	Finish	Description	Size	Lamp(s)
<b>P3624-09WB</b>	Brushed Nickel	Two-light w/ alabaster glass	14" dia., 6-5/8" ht.	2 13w GU24 CFL (included)
<b>P3624-20WB</b>	Antique Bronze			
<b>P3642-09WB</b>	Brushed Nickel	Two-light w/ etched glass	14" dia., 6-5/8" ht.	2 13w GU24 CFL (included)
<b>P3642-15WB</b>	Polished Chrome			
<b>P3642-20WB</b>	Antique Bronze			
<b>P3651-20WB</b>	Antique Bronze	Two-light w/light etched umber glass	14" dia., 6-5/8" ht.	2 13w GU24 CFL (included)
<b>P3660-20WB</b>	Antique Bronze	Two-light w/etched umber linen glass	14" dia., 6-5/8" ht.	2 13w GU24 CFL (included)



P3997-20WB

P3997-09WB

P3997-15WB



P3642-15WB



P3624-20WB

P3624-09WB



P3642-09WB

P3642-20WB



P3651-20WB



P3660-20WB

Close-to-ceiling





P3427-20WB





P3431-20WB

P3426-15WB

P3426-20WB

P3426-09WB

Product No.	Finish	Description	Size	Lamp(s)	
<b>P3425-09WB*</b>	Brushed Nickel	Two-light semi-flush w/ alabaster glass	12-3/4" dia., 11-3/8" ht.	2 13w GU24 CFL (included)	
<b>P3425-20WB*</b>	Antique Bronze				
<b>P3426-09WB*</b>	Brushed Nickel	Two-light semi-flush w/ etched glass	12-3/4" dia., 11-3/8" ht.	2 13w GU24 CFL (included)	
<b>P3426-15WB*</b>	Polished Chrome				
<b>P3426-20WB*</b>	Antique Bronze				
<b>P3427-20WB*</b>	Antique Bronze	Two-light semi-flush w/ light umber etched glass	12-3/4" dia., 11-3/8" ht.	2 13w GU24 CFL (included)	
<b>P3431-20WB*</b>	Antique Bronze	Two-light semi-flush w/etched umber linen glass	12-3/4" dia., 11-3/8" ht.	2 13w GU24 CFL (included)	

Product No.	Finish	Description	Size	Lamp(s)	
<b>P3527-20WB</b>	Antique Bronze	Three-light w/light etched umber glass	16-1/2" dia., 6-3/8" ht.	3 13w GU24 CFL (included)	
<b>P3602-20WB</b>	Antique Bronze	Three-light w/linen etched umber glass	16-1/2" dia., 6-3/8" ht.	3 18w GU24 CFL (included)	
<b>P3803-09WB</b>	Brushed Nickel	Three-light w/ alabaster glass	16-1/2" dia., 6-3/8" ht.	3 13w GU24 CFL (included)	
<b>P3803-20WB</b>	Antique Bronze				
<b>P3804-09WB</b>	Brushed Nickel	Three-light w/ etched glass	16-1/2" dia., 6-3/8" ht.	3 13w GU24 CFL (included)	
<b>P3804-15WB</b>	Polished Chrome				
<b>P3804-20WB</b>	Antique Bronze				

P3425-20WB

P3425-09WB

P3527-20WB

P3804-09WB

P3602-20WB

P3804-20WB

P3804-15WB

P3803-20WB

P3803-09WB

\* Semi-flush fixtures include mounting hardware for both stem and ceiling mount.

# Appeal

SQUARE CLOSE-TO-CEILING WITH ETCHED  
OPAL OR ALABASTER GLASS OPTIONS.

## TWO-LIGHT

**P3490-09** Brushed Nickel

**P3490-20** Antique Bronze  
Alabaster glass.

Size: 9" sq., 3-3/4" ht.

Lamps: Two medium base lamps,  
each 60w max.



P3490-09



P3490-20

## TWO-LIGHT

**P3551-09** Brushed Nickel

**P3551-20** Antique Bronze  
Alabaster glass.

Size: 11" sq., 3-3/4" ht.

Lamps: Two medium base  
lamps, each 75w max.



P3551-09



P3551-20

## TWO-LIGHT

**P3511-09** Brushed Nickel

**P3511-15** Polished Chrome  
**P3511-20** Antique Bronze

Etched opal glass.

Size: 11" sq., 3-3/4" ht.

Lamps: Two medium base  
lamps, each 75w max.



P3549-09



P3549-20



P3549-15

## TWO-LIGHT

**P3549-09** Brushed Nickel

**P3549-15** Polished Chrome

**P3549-20** Antique Bronze  
Etched opal glass.

Size: 9" sq., 3-3/4" ht.

Lamps: Two medium base  
lamps, each 60w max.



P3511-20



P3511-09



P3511-15

# Alabaster Glass

DOME SHAPED GLASS WITH SOLID TRIM AND DECORATIVE KNOBS. CHAIN AND CEILING MOUNTS BOTH INCLUDED.

Product No.	Finish	Description	Size	Lamp(s)
P3927-09 *	Brushed Nickel	Two-light	13-1/4 dia.,	2 medium base,
P3927-20 *	Antique Bronze	semi-flush	11-3/8" ht. Overall	each 100w max.
			ht. w/chain 50"	



# Semi-Flush

Product No.	Finish	Description	Size	Lamp(s)
P3460-09	Brushed Nickel	Two-light w/alabaster glass	13-1/4" dia.,	2 medium base,
P3460-09ET	Brushed Nickel	Two-light w/etched glass	13-3/4" ht.	each 60w max.
P3460-20	Antique Bronze	Two-light w/alabaster glass		
P3460-20ET	Antique Bronze	Two-light w/etched glass		



\* Fixture includes mounting hardware for both chain hung and ceiling mount.

# Incandescent Domes

DOME SHAPED GLASS WITH SOLID TRIM AND DECORATIVE KNOBS.



Product No.	Finish	Description	Size Lamp(s)
P3926-09	Brushed Nickel	Three-light w/alabaster glass	15-1/4" dia., 3 medium base, 6-5/8" ht. each 60w max.
P3926-09ET	Brushed Nickel	Three-light w/etched glass	
P3926-20	Antique Bronze	Three-light w/alabaster glass	
P3926-20ET	Antique Bronze	Three-light w/etched glass	
P3926-20EUL	Antique Bronze	Three-light w/etched umber linen glass	
P3926-20T	Antique Bronze	Three-light w/topaz glass	
P3926-30	White	Three-light w/alabaster glass	
P3926-80	Forged Black	Three-light w/etched glass	





P3924-09



P3924-80



P3924-20ET



P3924-09ET



P3924-30



P3924-20EUL



P3924-20T



P3924-20

Product No.	Finish	Description	Size	Lamp(s)
P3924-09	Brushed Nickel	One-light w/alabaster glass	11-3/8" dia.,	1 medium base,
P3924-09ET	Brushed Nickel	One-light w/etched glass	5-1/2" ht.	60w max.
P3924-20	Antique Bronze	One-light w/alabaster glass		
P3924-20ET	Antique Bronze	One-light w/etched glass		
P3924-20EUL	Antique Bronze	One-light w/etched umber linen glass		
P3924-20T	Antique Bronze	One-light w/topaz glass		
P3924-30	White	One-light w/alabaster glass		
P3924-80	Forged Black	One-light w/etched glass		



P3925-20ET



P3925-09ET



P3925-20



P3925-80



P3925-09



P3925-20EUL



P3925-20T



P3925-30

Product No.	Finish	Description	Size	Lamp(s)
P3925-09	Brushed Nickel	Two-light w/alabaster glass	13-1/4" dia.,	2 medium base,
P3925-09ET	Brushed Nickel	Two-light w/etched glass	5-7/8" ht.	each 75w max.
P3925-20	Antique Bronze	Two-light w/alabaster glass		
P3925-20ET	Antique Bronze	Two-light w/etched glass		
P3925-20EUL	Antique Bronze	Two-light w/etched umber linen glass		
P3925-20T	Antique Bronze	Two-light w/topaz glass		
P3925-30	White	Two-light w/alabaster glass		
P3925-80	Forged Black	Two-light w/etched glass		

- 120V AC Replaceable LED module
- 1211 lumen source
- 71.2 lumens/watt
- 3000K color temperature
- TM-21 60,000 hr. life

- Dimmable to 10% with many ELV type dimmers
- Acrylic Diffuser
- 90+ CRI
- CA Title 24 Compliant
- Wall or Ceiling Mount

## Helm

### LED ONE-LIGHT

**P3447-0930K9** Brushed Nickel  
**P3447-2030K9** Antique Bronze  
 Size: 11" sq., 3-3/4" ht.  
 Lamp: One 17w integral LED module included.



ADA

### LED TWO-LIGHT

**P3448-0930K9** Brushed Nickel  
**P3448-2030K9** Antique Bronze  
 Size: 14" sq., 3-3/4" ht.  
 Lamp: Two 17w integral LED modules included.



ADA

### LED THREE-LIGHT

**P3449-0930K9** Brushed Nickel  
**P3449-2030K9** Antique Bronze  
 Size: 18" sq., 3-3/4" ht.  
 Lamp: Three 17w integral LED modules included.



ADA



P3447-0930K9



P3447-2030K9



P3448-0930K9



P3448-2030K9



P3449-0930K9



P3449-2030K9

## Transit



P3432-2030K9



P3417-0930K9



P3417-2030K9



P3432-0930K9



P3411-0930K9



P3411-2030K9

### LED ONE-LIGHT

**P3411-0930K9** Brushed Nickel  
**P3411-2030K9** Antique Bronze  
 Size: 11" sq., 3-3/4" ht.  
 Lamp: One 17w integral LED module included.



ADA

### LED TWO-LIGHT

**P3417-0930K9** Brushed Nickel  
**P3417-2030K9** Antique Bronze  
 Size: 14" sq., 3-3/4" ht.  
 Lamp: Two 17w integral LED modules included.



ADA

### LED THREE-LIGHT

**P3432-0930K9** Brushed Nickel  
**P3432-2030K9** Antique Bronze  
 Size: 18" sq., 3-3/4" ht.  
 Lamp: Three 17w integral LED modules included.



ADA

## Bingo

DISTRESSED MIRROR CIRCULAR GLASS ACCENTS WITH ACRYLIC DIFFUSERS.



P3695-0930K9  
P3956-09

### THREE-LIGHT LINEAR

**P3695-0930K9** Brushed Nickel  
**P3695-7430K9** Venetian Bronze  
Size: 40" L., 11-5/8" W. 3-3/8" ht.  
Lamps: Three integral 17w LED modules included.



ADA



P3695-7430K9  
P3956-74

### THREE-LIGHT WALL OR CEILING

**P3747-0930K9** Brushed Nickel  
**P3747-7430K9** Venetian Bronze  
Size: 24" L., 23" W., 3-3/8" ht.  
Lamps: Three integral 17w LED modules included.



ADA



P3747-7430K9

### ONE-LIGHT WALL OR CEILING

**P3756-0930K9** Brushed Nickel  
**P3756-7430K9** Venetian Bronze  
Size: 18-3/4" dia., 3-3/8" ht.  
Lamp: One integral 17w LED module included.



ADA



P3756-0930K9

### THREE-LIGHT LINEAR

**P3956-09** Brushed Nickel  
**P3956-74** Venetian Bronze  
Size: 40" L., 11-5/8" W. 3-3/8" ht.  
Lamps: Six GU24 base CFL lamps, each 13w max.



ADA



P3756-7430K9





P3747-0930K9

# Eclipse

BRUSHED NICKEL, POLISHED BRASS AND ANTIQUE BRONZE FINISHES FEATURE SATIN OPAL GLASS.




15"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3480-20</b>	Antique Bronze	15-1/4" dia., 4-5/8" ht.	N/A	2 medium base, each 60w max.
<b>P3489-20EB</b>	Antique Bronze	15-1/4" dia., 4-5/8" ht.	120V/277V HPF electronic	2 13w 4-pin Quad CFL. G24q-1 base. 
<b>P3561-09</b> <b>P3561-10</b>	Brushed Nickel Polished Brass	15-1/4" dia., 4-5/8" ht.	N/A	2 medium base, each 60w max.
<b>P3562-09EB</b> <b>P3562-10EB</b>	Brushed Nickel Polished Brass	15-1/4" dia., 4-5/8" ht.	120V/277V HPF electronic	2 13w 4-pin Quad CFL. G24q-1 base. 

19"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3481-20</b>	Antique Bronze	19-3/8" dia., 5-1/2" ht.	N/A	3 medium base, each 60w max.
<b>P3563-09</b> <b>P3563-10</b>	Brushed Nickel Polished Brass	19-3/8" dia., 5-1/2" ht.	N/A	3 medium base, each 60w max.
<b>P3564-09EB</b> <b>P3564-10EB</b>	Brushed Nickel Polished Brass	19-3/8" dia., 5-1/2" ht.	120V/277V HPF electronic	3 13w 4-pin Quad CFL. G24q-1 base. 



27"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3482-09</b> <b>P3482-20</b>	Brushed Nickel Antique Bronze	27-3/8" dia., 7-1/8" ht.	N/A	4 medium base, each 60w max.
<b>P3491-20EB</b>	Antique Bronze	27-3/8" dia., 7-1/8" ht.	120V/277V HPF electronic	4 13w 4-pin Quad CFL. G24q-1 base. 





 Energy Star


15"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7315-20WB</b>	Antique Bronze	15-1/4" dia., 4-5/8" ht.	120V NPF electronic	2 13w 4-pin Quad CFL. G24q-1 base. (included) 
<b>P7324-09WB</b> <b>P7324-10EBWB</b>	Brushed Nickel Polished Brass	15-1/4" dia., 4-5/8" ht.	120V NPF electronic	2 13w 4-pin Quad CFL. G24q-1 base. (included) 

19"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7316-20WB</b>	Antique Bronze	19-3/8" dia., 5-1/2" ht.	120V NPF electronic	3 13w 4-pin Quad CFL. G24q-1 base. (included) 
<b>P7325-09WB</b> <b>P7325-10EBWB</b>	Brushed Nickel Polished Brass	19-3/8" dia., 5-1/2" ht.	120V NPF electronic	3 13w 4-pin Quad CFL. G24q-1 base. (included) 

27"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7326-09WB</b>	Brushed Nickel	27-3/8" dia., 7-1/8" ht.	120V NPF electronic	4 13w 4-pin Quad CFL. G24q-1 base. (included) 



P3483-20  
P3492-20EB



P3567-10





P7319-20WB




P7329-09WB

## 15"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3483-20</b>	Antique Bronze	15-1/4" dia., N/A 10-5/8" ht.		2 medium base, each 100w max.
<b>P3492-20EB</b>	Antique Bronze	15-1/4" dia., 120V/277V 10-5/8" ht.	HPF electronic	2 26w 4-pin Quad CFL. G24q-3 base. 
<b>P3567-09</b>	Brushed Nickel	15-1/4" dia., N/A		2 medium base, each 100w max.
<b>P3567-10</b>	Polished Brass	10-5/8" ht.		
<b>P3568-09EB</b>	Brushed Nickel	15-1/4" dia., 120V/277V 10-5/8" ht.	HPF electronic	2 26w 4-pin Quad CFL. G24q-1 base. 

## 19"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3484-20</b>	Antique Bronze	19-3/8" dia., N/A 13-1/4" ht.		3 medium base, each 100w max.
<b>P3569-09</b>	Brushed Nickel	19-3/8" dia., N/A		3 medium base, each 100w max.
<b>P3569-10</b>	Polished Brass	13-1/4" ht.		
<b>P3570-09EB</b>	Brushed Nickel	19-3/8" dia., 120V/277V 13-1/4" ht.	HPF electronic	3 26w 4-pin Quad CFL. G24q-1 base. 


## 27"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P3485-20</b>	Antique Bronze	27-3/8" dia., N/A 20-1/2" ht.		4 medium base, each 100w max.





Energy Star



## 15"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7327-09WB</b>	Brushed Nickel	15-1/4" dia., 120V NPF 10-5/8" ht.	electronic	2 13w 4-pin Quad CFL. GX24q-1 base. (incl) 

## 19"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7319-20WB</b>	Antique Bronze	19-3/8" dia., 120V NPF 13-1/4" ht.	electronic	3 26w 4-pin Quad CFL. G24q-3 base. (incl) 
<b>P7328-09WB</b>	Brushed Nickel	19-3/8" dia., 120V NPF 13-1/4" ht.	electronic	3 13w 4-pin Quad CFL. G24q-1 base. (incl) 

## 27"

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7320-20WB</b>	Antique Bronze	27-3/8" dia., 120V NPF 20-1/2" ht.	electronic	4 26w 4-pin Quad CFL. G24q-3 base. (incl) 
<b>P7329-09WB</b>	Brushed Nickel	27-3/8" dia., 120V NPF 20-1/2" ht.	electronic	4 26w 4-pin Quad CFL. G24q-1 base. (incl) 

Sconce

pg 494



Chandelier

pg 254





## Beyond

- 120V AC Replaceable LED module
- 1211 lumen source
- 71.2 lumens/watt
- 3000K color temperature
- TM-21 60,000 hr. life
- Dimmable to 10% with ELV type dimmers
- Acrylic Diffuser
- 90+ CRI
- CA Title 24 Compliant
- Wall or ceiling mount.



### ONE-LIGHT

**P2306-0930K9** Brushed Nickel  
Geometric glass with acrylic diffuser.  
Size: 12" sq., 6" ht.  
Lamp: One 17w integral LED module included.



### ONE-LIGHT

**P2307-0930K9** Brushed Nickel  
Textured glass with acrylic diffuser.  
Size: 12" dia., 6" ht.  
Lamp: One 17w integral LED module included.



P2309-0930K9

### ONE-LIGHT

**P2308-0930K9** Brushed Nickel  
Acrylic with white, bronze and brushed nickel knobs included.  
Size: 12" dia., 6" ht.  
Lamps: Two 17w integral LED modules included.



### ONE-LIGHT

**P2309-0930K9** Brushed Nickel  
Acrylic with white, bronze and brushed nickel knobs included.  
Size: 12" dia., 6" ht.  
Lamp: One 17w integral LED modules included.



P2311-0930K9

### ONE-LIGHT

**P2310-0930K9** Brushed Nickel  
Etched glass with brushed metal shade.  
Size: 10" dia., 5" ht.  
Lamps: Three 17w integral LED modules included.



### ONE-LIGHT

**P2311-0930K9** Brushed Nickel  
Etched glass with perforated metal shade.  
Size: 12" sq., 6" ht.  
Lamp: One 17w integral LED modules included.



P2310-0930K9

## Mini-Flush Mount

- Flicker free dimming with most ELV dimmers
- Wet location listed
- 90+CRI
- 120v input voltage AC
- 42,000 hour life
- 17w: 1050 Lumens  
63 Lumens per watt
- 12w: 630 Lumens  
52.5 Lumens per watt
- CA Title 24 Compliant

### ROUND

**P8022-20/30K9-AC1-L10** Antique Bronze  
**P8022-28/30K9-AC1-L10** White  
**P8022-31/30K9-AC1-L10** Black  
**P8022-82/30K9-AC1-L10** Metallic Gray  
 7-1/4" Round flush mount/recessed  
 Size: 7-1/4" dia., 1-1/4" ht.  
 Lamp: One integral 17w LED module included.



P8022-20/30K9-AC1-L10



P8022-28/30K9-AC1-L10



P8022-82/30K9-AC1-L10

### SQUARE

**P8027-20/30K9-AC1-L10** Antique Bronze  
**P8027-28/30K9-AC1-L10** White  
**P8027-31/30K9-AC1-L10** Black  
**P8027-82/30K9-AC1-L10** Metallic Gray  
 7-1/4" Square flush mount/recessed  
 Size: 7-1/4" dia., 1-1/4" ht.  
 Lamp: One integral 17w LED module included.



P8027-20/30K9-AC1-L10



P8027-28/30K9-AC1-L10



P8027-82/30K9-AC1-L10

### ROUND

**P8240-20/30K9-AC1-L06** Antique Bronze  
**P8240-28/30K9-AC1-L06** White  
**P8240-31/30K9-AC1-L06** Black  
**P8240-82/30K9-AC1-L06** Metallic Gray  
 5-1/2" Round flushmount  
 Size: 5-1/2" dia., 1-1/2" ht.  
 Lamp: One integral 12w LED module included.



P8240-20/30K9-AC1-L06



P8240-28/30K9-AC1-L06



P8240-31/30K9-AC1-L06



P8240-82/30K9-AC1-L06

### DECORATIVE ROUND

**P8247-09/30K9-AC1-L06** Brushed Nickel  
**P8247-20/30K9-AC1-L06** Antique Bronze  
**P8247-28/30K9-AC1-L06** White  
**P8247-31/30K9-AC1-L06** Black  
 Round with etched glass  
 Size: 5-1/2" round, 1-1/2" ht.  
 Lamp: One integral 12w LED module included.



P8247-09/30K9-AC1-L06



P8247-28/30K9-AC1-L06

### SQUARE

**P8241-20/30K9-AC1-L06** Antique Bronze  
**P8241-28/30K9-AC1-L06** White  
**P8241-31/30K9-AC1-L06** Black  
**P8241-82/30K9-AC1-L06** Metallic Gray  
 5-1/4" Square flushmount  
 Size: 5-1/4" sq., 1-1/2" ht.  
 Lamp: One integral 12w LED module included.



P8241-20/30K9-AC1-L06



P8241-28/30K9-AC1-L06

# Round Acrylic

WHITE ACRYLIC ENCASED IN DOUBLE TRIMMED FRAME.



P7249-09EBWB



P7249-174EBWB

Product No.	Finish	Description	Size	Ballast	Lamp(s)	ADA
P7249-09EBWB	Brushed Nickel	One-light	10-3/8" dia., 3-1/2" ht.	120V NPF electronic	1 22w FC8T9 circline (included)	
P7249-174EBWB	Urban Bronze					

# Maier CFL

ETCHED WHITE OPAL ACRYLIC FEATURES A SMOOTH ROUNDED FRAME. WALL OR CEILING MOUNT.

Product No.	Finish	Description	Size	Lamps	
P3675-09WB	Brushed Nickel	Three-light	18" dia., 5-1/4" ht.	3 26w GU24 CFL (included)	
P3675-30WB	White				
P3910-09	Brushed Nickel	One-light	9" dia., 4-3/8" ht.	1 26w GU24 CFL	
P3910-09WB	Brushed Nickel	One-light	9" dia., 4-3/8" ht.	1 26w GU24 CFL (included)	
P3911-09	Brushed Nickel	Two-light	14" dia., 4-3/4" ht.	2 26w GU24 CFL	
P3911-09WB	Brushed Nickel	Two-light	14" dia., 4-3/4" ht.	2 26w GU24 CFL (included)	



P3910-09  
P3910-09WB  
P3910-0930K9



P3911-09  
P3911-09WB  
P3911-0930K9

# Maier PROGRESS LED

- 120V AC Replaceable LED module
- 1211 lumen source
- 71.2 lumens/watt
- 3000K color temperature
- TM-21 60,000 hr. life
- Dimmable to 10% with ELV type dimmers
- Acrylic Diffuser
- 90+ CRI
- CA Title 24 Compliant

Product No.	Finish	Description	Size	Lamps	
P3675-0930K9	Brushed Nickel	Three-light	18" dia., 5-1/4" ht.	3 17w integral LED module included	
P3910-0930K9	Brushed Nickel	One-light	9" dia., 4-3/8" ht.	1 17w integral LED module included	
P3911-0930K9	Brushed Nickel	Two-light	14" dia., 4-3/4" ht.	2 17w integral LED module included	











P3675-30WB



P3675-09WB  
P3675-0930K9

# Round

WHITE CONTOURED ACRYLIC CLOUDS GRADUALLY  
EXTEND BEYOND SOLID TRIM. REGRESSED CHASSIS.  
WALL OR CEILING MOUNT.

Product No.	Finish	Description	Size	Ballast	Lamp(s)	ADA	
<b>P7372-30</b>	White	Two-light	13-3/4" dia., 3-1/4" ht.	120V NPF rapid start	1 22w FC8T9 and 1 32w FC12T9 circline	HPF	
<b>P7372-30STRWB</b>	White	Two-light	13-3/4" dia., 3-1/4" ht.	120V NPF electronic	2 13w 4-pin Quad CFL G24q-1 base (included)	ADA	
<b>P7373-30</b>	White	Two-light	19" dia., 4-1/4" ht.	120V HPF rapid start	1 32w FC12T9 and 1 40w FC16T9 circline		
<b>P7375-30STRWB</b>	White	One-light	9" dia., 3-1/4" ht.	120V NPF electronic	1 13w 4-pin Quad CFL G24q-1 base (included)	ADA	
<b>P7376-30</b> <b>P7376-31</b>	White Black	Two-light	11" dia., 3-1/4" ht.	120V NPF	2 13w 2-pin twin CFL GX23 base	HPF	
<b>P7376-3030K9</b>	White	One-light	11" dia., 3-1/4" ht.	120V NPF	1 17w integral LED module included	ADA	
<b>P7377-30</b>	White	One-light	11" dia., 3" ht.	120V NPF	1 22w FC8T9 circline	ADA	
<b>P7378-30</b>	White	Three-light	14" dia., 3-3/4" ht.	120V NPF	3 13w 2-pin twin CFL GX23 base	ADA	



P7373-30

P7372-30  
P7372-30STRWB

P7376-31



P7375-30STRWB



P7378-30








P7377-30

P7376-30  
P7376-3030K9

## Round Clouds



WHITE CONTOURED ACRYLIC CLOUDS WITH SMOOTH FINISH TEXTURE. TWIST ON INSTALLATION. WALL OR CEILING MOUNT.

Product No.	Finish	Description	Size	Ballast	Lamps	ADA	
<b>P7383-30</b>	White	Two-light	14" dia., 3-5/8" ht.	120V NPF	1 22w FC8T9 circline & 1 32w FC12T9 circline	ADA	
<b>P7384-30</b>	White	Two-light	18-1/8" dia., 4-1/8" ht.	120V NPF	1 32w FC12T9 circline & 1 40w FC16T9 circline		
<b>P7384-30WB</b>	White	Four-light	18" dia., 4-1/8" ht.	120V NPF	4 13w GU24 CFL (included)		
<b>P7385-30</b>	White	One-light	10-7/8" dia., 3-1/4" ht.	120V NPF	1 22w FC8T9 circline	ADA	
<b>P7385-3030K9</b>	White	One-light	10-7/8" dia., 3-1/4" ht.		1 17w integral LED module included	ADA	

PROGRESS **LED**




## Round Clouds

WHITE CONTOURED ACRYLIC CLOUDS.

Product No.	Finish	Description	Size	Lamps	ADA	
<b>P3433-30WB</b>	White	One-light	10-7/8" dia., 3-1/4" ht.	One GU24 CFL lamps, each 13w max (included).	ADA	
<b>P3637-30WB</b>	White	Two-light	14" dia., 3-5/8" ht.	Two GU24 CFL lamps each 13w, (included).	ADA	

## Round Clouds

WHITE CONTOURED ACRYLIC CLOUDS SUSPEND OVERHEAD WITH A ROUNDED FINISH. REGRESSED CHASSIS. WALL OR CEILING MOUNT.

Product No.	Finish	Description	Size	Ballast	Lamp(s)	ADA	
<b>P7307-60</b>	White	One-light	16" dia., 4" ht.	120V NPF	1 32w FC12T9 circline	ADA	
<b>P7309-60</b>	White	Two-light	20" dia., 4-1/2" ht.	120V HPF	1 32w FC12T9 and 1 40w FC16T9 circline		
<b>P7310-60EB</b>	White	Two-light	16" dia., 4" ht.	120V HPF electronic	2 13w 4-pin Quad CFL G24q-1 base	ADA	



P7384-30



P7383-30



P7384-30WB



P7385-30



P3433-30WB



P3637-30WB



P7307-60  
P7310-60EB







P7309-60



## Squares

WHITE ACRYLIC DIFFUSER WITH RECTILINEAR FORMS.  
REGRESSED WHITE CHASSIS. SWING ACTION LATCHES ON  
DIFFUSER. WALL OR CEILING MOUNT.

Product No.	Finish	Description	Size	Ballast	Lamps	ADA	
<b>P7379-30</b>	White	Two-light	15" sq., 3-1/8" ht.	120V NPF	1 22w FC8T9 circline & 1 32w FC12T9 circline	ADA	
<b>P7380-30</b>	White	Two-light	19" sq., 3-1/8" ht.	120V NPF	1 32w FC12T9 circline 1 40w FC16T9 circline	ADA	
<b>P7381-30</b>	White	Three-light	15" sq., 3" ht.	120V NPF	3 13w 2-pin twin CFL GX23 base	ADA	
<b>P7382-30</b>	White	Two-light	12-1/2" sq., 3-1/8" ht.	120V NPF	2 13w 2-pin twin CFL GX23 base	ADA	



P7382-30



P7381-30





P7379-30



P7380-30

## Squares

WHITE POLYCARBONATE DIFFUSER. LOW PROFILE, IMPACT  
RESISTANT POLYCARBONATE FRAME. MOUNTS FLUSH UNDER  
SHELVES.

Product No.	Finish	Description	Size	Ballast	Lamp(s)	ADA	
<b>P7118-30</b>	White	Two-light	12" sq., 2-1/4" ht.	120V NPF	2 13w 2-pin twin CFL GX23 base	ADA	
<b>P7182-30</b>	White	Two-light	9-1/2" sq., 2" ht.	120V NPF	2 7w or 2 9w 2-pin twin CFL G23 base	ADA	



P7118-30



P7182-30

## White Glass

WHITE GLASS BOWL WITH WHITE TRIM.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3516-30</b>	White	One-light	6-3/4" dia., 4-3/4" ht.	1 medium base, 60w max.
<b>P3518-30</b>	White	Two-light	8-3/4" dia., 5" ht.	2 medium base, each 60w max.
<b>P3520-30</b>	White	Two-light	10-3/4" dia., 5-3/8" ht.	2 medium base, each 75w max.



P3516-30



P3518-30



P3520-30



P3524-60



P3526-60



P3528-60

## Round Glass

SATIN OPAL CASED GLASS.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3524-60</b>	White	One-light	8-1/4" dia., 5" ht.	1 medium base, 60w max.
<b>P3526-60</b>	White	One-light	10-1/8" dia., 5-1/2" ht.	1 medium base, 100w max.
<b>P3528-60</b>	White	Two-light	12" dia., 7-1/2" ht.	2 medium base, each 75w max.

## Clear Prismatic Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3405-30</b>	White	One-light	7-1/2" dia., 4-3/4" ht.	1 medium base, 60w max.
<b>P3406-30</b>	White	Two-light	9-1/2" dia., 5-1/4" ht.	2 medium base, each 60w max.



P3406-30



P3405-30

## Glass Globes

WHITE AND CLEAR RIBBED GLASS.



P3599-20



P3599-09

Product No.	Finish	Description	Size	Lamp(s)
<b>P3203-30</b>	White	White glass globe	6" dia., 7" ht.	1 medium base, 60w max.
<b>P3401-09</b>	Brushed Nickel	One-light with alabaster glass globe.	6" dia., 7-1/4" ht.	1 medium base, 60w max.
<b>P3599-09</b>	Brushed Nickel	One-light with clear, ribbed glass globe. K.O. for switch.	6" dia., 7-1/4" ht.	1 medium base, 60w max.
<b>P3599-20</b>	Antique Bronze			
<b>P3599-30</b>	White			
<b>P3605-30</b>	White	White glass globe. K.O. for switch.	6" dia., 7-1/4" ht.	1 medium base, 60w max.
<b>P3605-30SW</b>	White	White glass globe with pullchain switch.	6" dia., 7-1/4" ht.	1 medium base, 60w max.
<b>P3705-30</b>	White	White glass globe	8" dia., 9-1/2" ht.	1 medium base, 100w max.
<b>P3750-10</b>	Polished Brass	Clear patterned acorn glass. K.O. for switch.	5-1/2" dia., 9-1/2" ht.	1 medium base, 60w max.



P3750-10



P3599-30



P3605-30SW



P3203-30



P3605-30




P3401-09



P3705-30

## Acrylic Globes

WHITE SHATTER RESISTANT ACRYLIC GLOBE.

Product No.	Finish	Description	Size	Ballast	Lamp(s)
<b>P3213-30</b>	White	One-light. Polycarbonate canopy.	6" dia., 8" ht.	N/A	1 medium base 60w max.
<b>P3623-30</b>	White	One-light	6" dia., 7-1/4" ht.	120V NPF	1 7w 2-pin twin CFL G23 base 



P3213-30



P3623-30

## Swirled Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3536-30</b>	Textured White	Two-light	11-3/4" dia., 6" ht.	2 medium base, 60w max.
<b>P3538-30</b>	Textured White	Three-light	15-1/4" dia., 6-1/4" ht.	3 medium base, each 60w max.
<b>P3547-30EBWB</b>	Textured White	Two-light	12-3/4" dia., 6" ht.	2 13w GU24 CFL (included)
<b>P3548-30EBWB</b>	Textured White	Three-light	15-1/2" dia., 6" ht.	3 13w GU24 CFL (included)



P3536-30



P3547-30EBWB



P3538-30  
P3548-30EBWB

## Clear Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3645-09 *</b> <b>P3645-20 *</b>	Brushed Nickel Antique Bronze	Three-light	8-3/8" dia., 14-1/2" ht.	3 candelabra base, each 60w max.
<b>P3690-09 *</b> <b>P3690-20 *</b>	Brushed Nickel Antique Bronze	Two-light	8-3/4" sq., 8-3/4" ht.	2 candelabra base, each 60w max.



P3690-09



P3645-09



P3690-20

# Octagonal Beveled Glass

THREE-LIGHT  
**P5788-09** Brushed Nickel  
**P5788-10** Polished Solid Brass  
**P5788-20** Antique Bronze  
Size: 9-3/4" dia., 5-7/8" ht.  
Lamps: Three G16.5 candelabra base lamps, each 25w max.

FOUR-LIGHT  
**P5789-09** Brushed Nickel  
**P5789-10** Polished Solid Brass  
**P5789-20** Antique Bronze  
Size: 11-1/8" dia., 6-1/4" ht.  
Lamps: Four G16.5 candelabra base lamps, each 25w max.

Chandelier  
pg 252



# Beveled Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3730-10</b>	Polished Solid Brass	Three-light	10" dia., 6-1/4" ht.	3 candelabra base, each 40w max.
<b>P3731-10</b>	Polished Solid Brass	Four-light	13" dia., 6-1/4" ht.	4 candelabra base, each 40w max.
<b>P5834-10 *</b>	Polished Solid Brass	One-light Six-sided	7" W., 10" ht.	1 medium base, 100w max.



\* Fixture includes mounting hardware for both chain hung and ceiling mount.



## 6" Fitter

Product No.	Finish	Description	Size	Lamp(s)
<b>P3408-09</b>	Brushed Nickel	One-light	7-1/2" dia.,	1 medium base, 60w max.
<b>P3408-10</b>	Polished Brass	One-light	4-3/8" ht.	
<b>P3408-20</b>	Antique Bronze	One-light		
<b>P3408-30</b>	White	One-light		
<b>P3408-09WB</b>	Brushed Nickel	One-light	7-1/2" dia., 4-3/8" ht.	1 13w GU24 included
<b>P3408-0930K9</b>	Brushed Nickel	One-light	7-1/2" dia., 4-3/8" ht.	1 17w integral LED Module included

PROGRESS **LED**



P3408-09  
P3408-09WB  
P3408-0930K9



P3408-10



P3408-20



P3408-30

## 8" Fitter

Product No.	Finish	Description	Size	Lamp(s)
<b>P3410-09</b>	Brushed Nickel	Two-light	9-1/2" dia.,	2 medium base, each 60w max.
<b>P3410-10</b>	Polished Brass	Two-light	5-1/4" ht.	
<b>P3410-20</b>	Antique Bronze	Two-light		
<b>P3410-30</b>	White	Two-light		
<b>P3410-09WB</b>	Brushed Nickel	Two-light	9-1/2" dia., 5-1/4" ht.	2 13w GU24 included



P3410-09  
P3410-09WB



P3410-10



P3410-20



P3410-30

## 10" Fitter

Product No.	Finish	Description	Size	Lamp(s)
<b>P3412-09</b>	Brushed Nickel	Two-light w/white glass	11-3/4" dia.,	2 medium base, each 75w max.
<b>P3412-10</b>	Polished Brass	Two-light w/white glass	5-1/4" ht.	
<b>P3412-20</b>	Antique Bronze	Two-light w/white glass		
<b>P3412-30</b>	White	Two-light w/white glass		



P3412-10



P3412-20



P3412-09



P3412-30

## 10" Fitter

Product No.	Finish	Description	Size	Lamp(s)
<b>P7312-30EBWB</b>	White	Two-light. White glass	11-3/4" dia., 6" ht.	2 13w GU24 CFL included



P7312-30EBWB

## Round Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P4609-30</b>	White	White glass shade	12" dia., 5-1/2" ht.	2 medium base, each 60w max.
<b>P4610-30</b>	White	White glass shade	14-1/2" dia., 7" ht.	3 medium base, each 100w max.



P4609-30



P4610-30

## Square Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P4961-30</b>	White	White glass	12" sq., 5-1/2" ht.	2 medium base, each 60w max.
<b>P4962-30</b>	White	Patterned white glass	12" sq., 5-1/2" ht.	2 medium base, each 60w max.
<b>P4971-30</b>	White	White glass	14" sq., 7" ht.	2 medium base, each 60w max.



P4961-30




P4962-30



P4971-30

# North Park



Product No.	Finish	Reversible Blades			Description	CTC installation
P2531-09	Brushed Nickel	Natural Cherry		Cherry		
P2531-20	Antique Bronze	Cherry		Classic Walnut		

Size: 52" dia., 16" ht.  
 CTC 11" ht.  
 30-year limited warranty  
 45" Canopy  
 SureConnect® System  
 Compatible with universal  
 light kits



Shown: P2531-09 fan

ENERGY INFORMATION AT HIGH SPEED	
AIRFLOW:	5,275 cubic feet per minute
ELECTRICITY USE:	57 watts (excludes lights)
AIRFLOW EFFICIENCY:	93 cubic feet per minute per watt



P2531-09  
 Brushed Nickel with  
 Natural Cherry blades



 

 



P2531-20  
 Antique Bronze with  
 Cherry blades



Chandelier  
 pg 198

# 54" Signature Plus Fan



Product No.	Finish	Reversible Blades				Description
P2530-09	Brushed Nickel	Silver		Natural Cherry		Size: 54" dia., 15" ht. 30-year limited warranty 45" Canopy Compatible with universal light kits
P2530-20	Antique Bronze	Classic Walnut		Medium Cherry		
P2530-30W	White	White		White		



Shown: P2530-30 fans

## ENERGY INFORMATION AT HIGH SPEED

AIRFLOW:	6,210 cubic feet per minute
ELECTRICITY USE:	66 watts (excludes lights)
AIRFLOW EFFICIENCY:	94 cubic feet per minute per watt



P2530-30W  
White with white blades



P2530-20  
Antique Bronze with  
Classic Walnut blades



 
P2530-09  
Brushed Nickel with  
Silver blades

Ceiling fans are not available in Canada.





# Trevina

Product No.	Finish	Blades	Description
P2514-09	Brushed Nickel	Silver 	Size: 52" dia., 18" ht. Etched opal glass 30-yr limited warranty Full function remote included Lamp: One mini-can E-11, 100w max. (included)



Full Function Remote Included  
Full-range dimming for light  
Three-speed fan operation  
Reverse direction control



Shown: P2514-09 fan



P2514-09  
Brushed Nickel with  
Silver blades

## ENERGY INFORMATION AT HIGH SPEED

AIRFLOW:	4,566 cubic feet per minute
ELECTRICITY USE:	55 watts (excludes lights)
AIRFLOW EFFICIENCY:	83 cubic feet per minute per watt



# 52" Performance Fan



Product No.	Finish	Reversible Blades		Description		CTC installation
P2503-09	Brushed Nickel	Natural Cherry		Cherry		
P2503-30W	White	White		White		
P2503-46	Weathered Bronze	Dark Teak		Oak		

## ENERGY INFORMATION AT HIGH SPEED


AIRFLOW: 5,989 cubic feet per minute  
ELECTRICITY USE: 71 watts (excludes lights)  
AIRFLOW EFFICIENCY: 85 cubic feet per minute per watt



P2503-09  
Brushed Nickel  
with Natural  
Cherry blades



P2503-46  
Weathered Bronze with  
Dark Teak blades

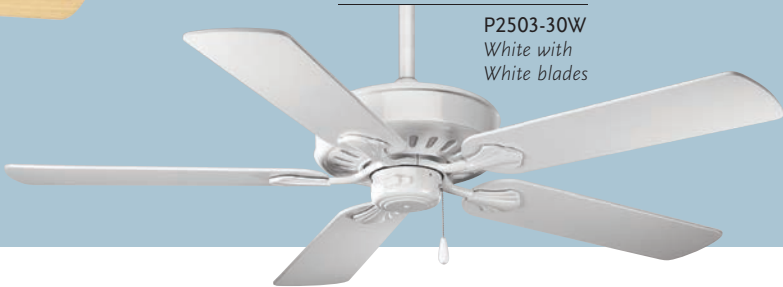

P2503-30W  
White with  
White blades

## SureConnect® System



Motor screws pre-installed in blade arms to prevent them from falling out during installation.

Special guides perfectly align blade arms to motor.

Preinstalled rubber isolation pads prevent vibration noise.

Ceiling fans are not available in Canada.

## 45° Canopy



Standard canopy works with sloped ceilings up to 45° (12:12 ceiling pitch)

Outlet box mounting plate includes convenient hands-free hanger for wiring.

Oversize, textured die-cast hanger ball reduces vibrations that can cause noise and wobble.

Dual-mount for downrod or close-to-ceiling installation (on select fans)

# 52" Signature Fan



P2521-09WA  
Brushed Nickel with  
Classic Walnut blades

Product No.	Finish	Reversible Blades				Description	CTC installation
P2521-09	Brushed Nickel	White		Natural Cherry		Size: 52" dia., 14-5/8" ht. CTC 11-9/16" ht. 30-year limited warranty 45" Canopy SureConnect® System Compatible with universal light kits	
P2521-09CH	Brushed Nickel	Cherry		Natural Cherry			
P2521-09WA	Brushed Nickel	Classic Walnut		Dark Walnut			
P2521-20	Antique Bronze	Classic Walnut		Medium Cherry			
P2521-77	Forged Bronze	Classic Walnut		Medium Cherry			
P2521-80	Forged Black	Dark Walnut		Dark Cherry			
P2521-81	Antique Nickel	Cherry		Medium Oak			

ENERGY INFORMATION AT HIGH SPEED

AIRFLOW: 5,422 cubic feet per minute

ELECTRICITY USE: 63 watts (excludes lights)

AIRFLOW EFFICIENCY: 94 cubic feet per minute per watt



P2521-09  
Brushed Nickel with  
White Blades



P2521-09CH  
Brushed Nickel with  
Cherry Blades



P2521-81  
Antique Nickel  
with Cherry blades



**P2521-77**  
*Forged Bronze with  
Classic Walnut blades*



**P2521-20**  
*Antique Bronze with  
Classic Walnut Blades*



**P2521-09**  
*Brushed Nickel with  
Natural Cherry Blades*



**P2521-80**  
*Forged Black with  
Dark Cherry blades*



**P2655-01** Set of five  
palm blades for P2521  
fans. Cherry finish.


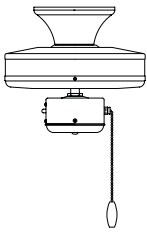






**P2521-20**  
*shown with P2655-01  
accessory blades*

*Ceiling fans are not available in Canada.*

# 52" Builder Fan



Product No.	Finish	Reversible Blades		Description	CTC installation
P2501-09	Brushed Nickel	Cherry		Natural Cherry	
P2501-20	Antique Bronze	Medium Cherry		Classic Walnut	
P2501-30	White	White		Washed Oak	
P2501-30W	White	White		White	
P2501-144	Pebbles	Medium Cherry		Classic Walnut	

## ENERGY INFORMATION AT HIGH SPEED

AIRFLOW: 5,266 cubic feet per minute  
ELECTRICITY USE: 64 watts (excludes lights)  
AIRFLOW EFFICIENCY: 82 cubic feet per minute per watt




P2501-09  
Brushed Nickel with  
Cherry blades



P2501-144  
Pebbles with  
Medium Cherry blades


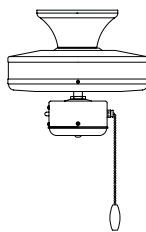



P2501-20  
Antique Bronze with  
Medium Cherry blades

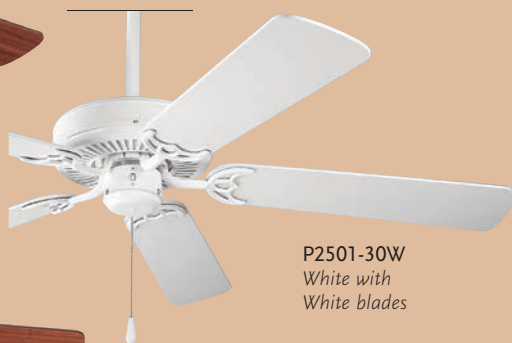

P2501-30W  
White with  
White blades

# 52" Builder Fan & Light

Product No.	Finish	Reversible Blades		Description	CTC installation	
P2522-09	Brushed Nickel	Cherry		Natural Cherry		
				Alabaster glass bowl Size: 52" dia., 19-1/8" ht. CTC 15-7/16" ht. Lamps: Three candelabra base lamps, each 40w max. 30-year limited warranty 45" Canopy SureConnect® System		
P2522-09 Brushed Nickel with Natural Cherry blades				ENERGY INFORMATION AT HIGH SPEED		
				AIRFLOW: 5,182 cubic feet per minute		
				ELECTRICITY USE: 60 watts (excludes lights)		
				AIRFLOW EFFICIENCY: 84 cubic feet per minute per watt		

# 42" Builder Fan

Product No.	Finish	Reversible Blades			Description	CTC installation
P2500-09	Brushed Nickel	Cherry		Natural Cherry	Size: 42" dia., 12-1/4" ht. 8-1/2" CTC ht., 72" lead wires 15-year limited warranty Quick-Install canopy SureConnect® System Compatible with universal light kits	
P2500-20	Antique Bronze	Classic Walnut		Medium Cherry		
P2500-30	White	White		Washed Oak		

## ENERGY INFORMATION AT HIGH SPEED

AIRFLOW:	2,415 cubic feet per minute
ELECTRICITY USE:	49 watts (excludes lights)
AIRFLOW EFFICIENCY:	50 cubic feet per minute per watt


## Quick-Install Canopy





Securely holds fan for wiring during installation.  
Installs without removing screws from electrical box.


Dual-mount for downrod or close-to-ceiling installation.

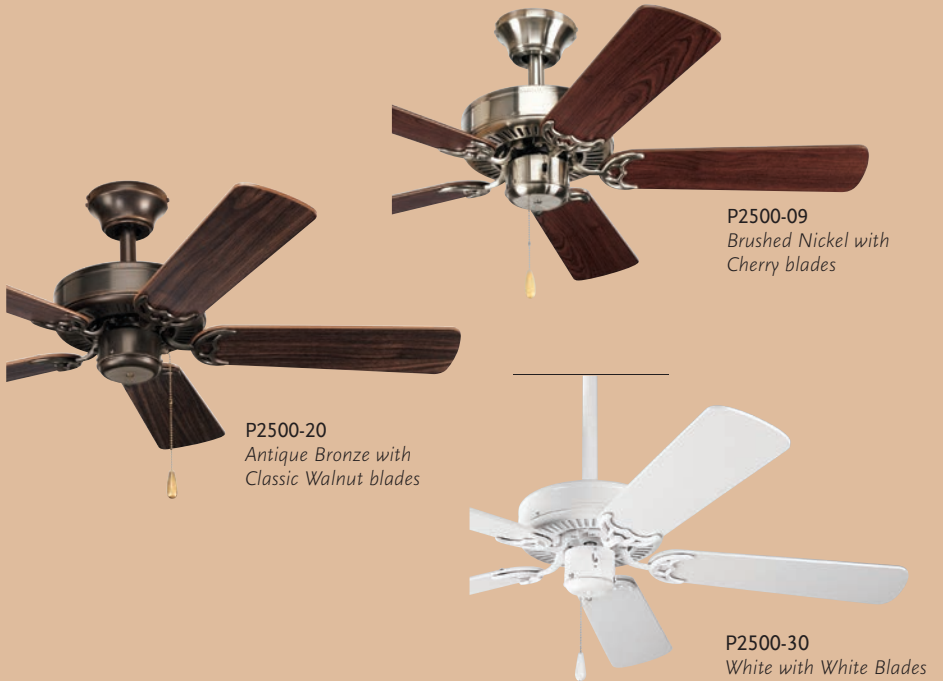Works with sloped ceilings up to 23° (4:12 ceiling pitch)



# 42" Hugger Fan

Product No.	Finish	Reversible Blades			Description
P2524-09	Brushed Nickel	Cherry		Natural Cherry	Size: 42" dia., 8-5/16" ht. Hugger style housing, four blades 15-year limited warranty Compatible with universal light kits
P2524-30	White	White		White	

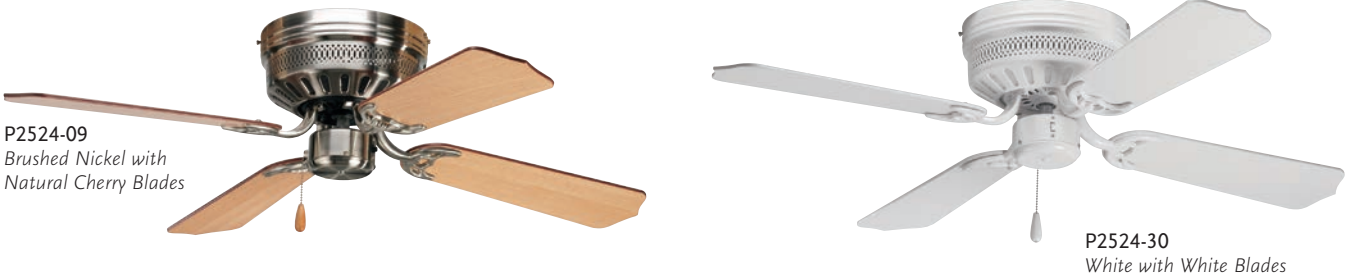

Ceiling fans are not available in Canada.



# 52" Hugger Fan

Product No.	Finish	Reversible Blades		Description
P2525-09	Brushed Nickel	Cherry	Natural Cherry	Size: 52" dia., 8-1/8" ht. 15-year limited warranty Compatible with universal light kits
P2525-30	White	White	White	




P2525-09  
Brushed Nickel with  
Cherry Blades



P2525-30  
White with  
White Blades

# 54" Patio Fan

Product No.	Finish	Blades	Description	CTC installation
P2533-20	Antique Bronze	Toasted Oak	Size: 54" dia., 17-3/8" ht. 12-3/16" CTC ht., 80" lead wires SureConnect® System 30-year limited warranty 45° Canopy	ABS all-weather blades Compatible with universal light kits Wet location listed


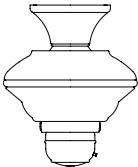




P2533-20  
Antique Bronze with  
Toasted Oak blades

## ENERGY INFORMATION AT HIGH SPEED

 AIRFLOW:	5,947 cubic feet per minute
ELECTRICITY USE:	68 watts (excludes lights)
AIRFLOW EFFICIENCY:	87 cubic feet per minute per watt
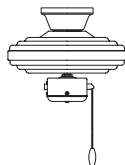
# 52" Patio Fan

Product No.	Finish	Blades	Description			CTC installation
P2502-20	Antique Bronze	Oak		Size: 52" dia., 17-3/8" ht. 12-3/16" CTC ht. 72" lead wires SureConnect® System 15-year limited warranty	Quick-Install canopy ABS all-weather blades Compatible with universal light kits Wet location listed	
P2502-30	White	White				
P2502-80	Forged Black	Toasted Oak				


 
ENERGY INFORMATION AT HIGH SPEED

AIRFLOW: 5,061 cubic feet per minute  
ELECTRICITY USE: 56 watts (excludes lights)  
AIRFLOW EFFICIENCY: 90 cubic feet per minute per watt



Shown P2502-20 fan

# 52" Patio Fan

Product No.	Finish	Blades	Description		CTC installation	
P2526-20	Antique Bronze	Washed Walnut		Size: 52" dia., 17-3/8" ht. 12-3/16" CTC ht., 80" lead wires SureConnect® System 15-year limited warranty 45° Canopy	ABS all-weather blades Compatible with universal light kits Damp location listed	



ENERGY INFORMATION AT HIGH SPEED

AIRFLOW: 4,150 cubic feet per minute  
ELECTRICITY USE: 70 watts (excludes lights)  
AIRFLOW EFFICIENCY: 59 cubic feet per minute per watt

Ceiling fans are not available in Canada.

## Calven

**P2645-80** Forged Black  
Universal-style with quick-connect wiring.  
Size: 12" dia., 5-3/4" ht.  
Lamps: Three candelabra base lamps, 40w max. (included).



P2645-80

Chandelier

pg 166



## Torino

**P2645-09** Brushed Nickel with etched glass  
**P2645-77** Forged Bronze with tea-stained glass  
Universal-style with quick-connect wiring.  
Size: 12" dia., 5-3/4" ht.  
Lamps: Three candelabra base lamps, 40w max (included).



P2645-09

Chandelier

pg 126



P2645-77



Shown P2503-09 fan with P2645-09 light kit

## Riverside

**P2651-20** Antique Bronze with etched light topaz wave glass  
Universal-style with quick-connect wiring.  
Size: 13" dia., 5-1/4" ht.  
Lamps: Three candelabra base lamps, 40w max (included).



P2651-20

Chandelier

pg 114



*Ceiling fans are not available in Canada.*

# Wisten

**P2649-09** Brushed Nickel  
**P2649-20** Antique Bronze  
 Etched glass.  
 Universal-style light kit with  
 quick-connect wiring.  
 Size: 11" dia., 6" ht.  
 Lamps: Three candelabra base  
 lamps, each 40w max, included.



P2649-09



P2649-20

Chandelier

pg 170



# Gather, Bravo & Joy

**P2650-09** Brushed Nickel  
**P2650-20** Antique Bronze  
**P2650-20T** Antique Bronze with  
 tea-stained glass  
 Universal-style light kit with  
 quick-connect wiring.  
 Size: 11" dia., 5-1/2" ht.  
 Lamps: Three candelabra base  
 lamps, each 40w max (included).



P2650-09



P2650-20T



P2650-20

Gather Chandelier

pg 236



Bravo Chandelier

pg 188



Joy Chandelier

pg 182



# North Park

**P2654-09** Brushed Nickel  
**P2654-20** Antique Bronze  
 Etched glass. Universal-style with  
 quick-connect wiring.  
 Size: 12-1/2" sq., 6-1/4" ht.  
 Lamps: Three candelabra base  
 lamps, 40w max., included.



P2654-09



P2654-20

Chandelier

pg 198



## Kensington

**P2656-09** Brushed Nickel with etched glass  
**P2656-77** Forged Bronze with tea-stained glass  
 Universal-style with quick-connect wiring.  
 Size: 12" dia., 6" ht.  
 Lamps: Three candelabra base lamps, 40w max. (included).



P2656-09



P2656-77

Chandelier  
 pg 120



## Madison

**P2623-09** Brushed Nickel  
**P2623-20** Antique Bronze  
 Etched glass.  
 Universal-style light kit with quick-connect wiring.  
 Size: 18" dia., 7-1/2" ht.  
 Lamps: Three medium base lamps, each 60w max.  
 Three medium base CFL included (non-dimmable).



P2623-20



P2623-09  
 Shown on P2521-09 Fan

Chandelier  
 pg 220



## Renovations

**P2625-77** Forged Bronze  
**P2625-81** Antique Nickel  
 Etched glass.  
 Universal-style light kit with quick-connect wiring.  
 Size: 19" dia., 8" ht.  
 Lamps: Four medium base lamps, each 60w max.  
 Four medium base CFL included (non-dimmable).



P2625-81



P2625-77

Chandelier  
 pg 144





# Trinity

**P2628-09** Brushed Nickel  
**P2628-20** Antique Bronze  
**P2628-77** Forged Bronze  
**P2628-81** Antique Nickel  
 Etched glass.  
 Universal-style with quick-connect wiring.  
 Size: 13-3/8" dia., 6-3/8" ht.  
 Lamps: Three candelabra base lamps, each 40w max., included.



Chandelier  
 pg 224



# Universal Bowl

**P2612-09** Brushed Nickel  
**P2612-20** Antique Bronze  
**P2612-20T** Antique Bronze with tea stained glass  
**P2612-30** White  
**P2612-46** Weathered Bronze  
**P2612-144** Pebbles with light etched umber glass  
 Alabaster glass.  
 Universal-style with quick-connect wiring.  
 Size: 10-3/4" dia., 6" ht.  
 Lamps: Three candelabra base lamps, each 40w max., included.

Ceiling fans are not available in Canada.

## Four Light Universal

**P2643-09** Brushed Nickel

**P2643-20** Antique Bronze

**P2643-20T** Antique Bronze  
with tea stained glass

**P2643-30** White

**P2643-144** Pebbles with light  
etched umber glass

Alabaster glass.

Universal-style with  
quick-connect wiring.

Size: 13-5/8" dia., 7" ht.

Lamps: Four candelabra base  
lamps, each 40w max., included.



P2643-20T



P2643-144



P2643-09



P2643-30



P2643-20

## Three Light Universal

**P2642-09** Brushed Nickel

**P2642-30** White

**P2642-144** Pebbles with light  
etched umber glass

Alabaster glass.

Universal-style with  
quick-connect wiring.

Size: 13-5/8" dia., 7" ht.

Lamps: Three candelabra base  
lamps, each 60w max., included.



P2642-30



P2642-09



P2642-144

## Four Light Alabaster

**P2610-09** Brushed Nickel

**P2610-20** Antique Bronze

**P2610-30** White

Alabaster glass. Spring clip glass attachment.

Size: 15" dia., 6-1/4" ht.

Lamps: Four medium base lamps, each 60w max. Four medium base CFL included (non-dimmable).

**P2616-46** Weathered Bronze

Alabaster glass. Spring clip glass attachment.

Size: 15-1/4" dia., 7-1/2" ht.

Lamps: Four medium base lamps, each 60w max. Four 13w medium base CFL included (non-dimmable). For use with P2503 only.




P2616-46

For use with P2500, P2501, P2524 and P2525. Can be used with P2502 indoors.



P2610-09

P2610-20

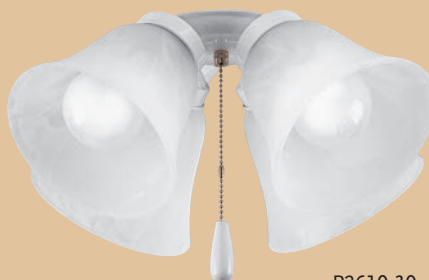

P2610-30



## Three Light Alabaster

**P2600-09** Brushed Nickel

**P2600-20** Antique Bronze

**P2600-30** White

Alabaster glass. Spring clip glass attachment.

Size: 15" dia., 6-5/8" ht.

Lamps: Three medium base lamps, each 60w max. Three medium base CFL included (non-dimmable).

For use with P2500, P2501, P2524 and P2525. Can be used with P2502 indoors.



P2600-20



P2600-09



P2600-30

*Ceiling fans are not available in Canada.*

## Schoolhouse

**P2644-09** Brushed Nickel

**P2644-20** Antique Bronze

**P2644-30** White

White opal glass.

Universal-style with quick-connect wiring.

Size: 6-1/2" dia., 8-1/2" ht.

Lamp: One medium base lamp, 100w max. One medium base CFL included (non-dimmable).



P2644-09



P2644-20



P2644-30



P2644-30  
Shown on P2502-30 Fan

## Low Profile

**P2602-09** Brushed Nickel

**P2602-20** Antique Bronze

**P2602-30** White

Opal glass.

Universal-style with quick-connect wiring.

Size: 10-1/2" dia., 3-13/16" ht.

Lamp: Two candelabra base lamps, each 60w max., included.



P2602-20



P2602-30



P2602-09

## Gather

**P2658-09WB** Brushed Nickel  
**P2658-20WB** Antique Bronze  
 Universal-style light kit with quick-connect wiring.  
 Size: 11" dia., 5-1/2" ht.  
 Lamps: Two 13w GU24 CFL, included (non-dimmable).



P2658-09WB



P2658-20WB

## Alabaster Bowl

**P2621-09EBWB** Brushed Nickel  
**P2621-20EBWB** Antique Bronze  
**P2621-30EBWB** White  
 Alabaster glass.  
 Universal-style with quick-connect wiring.  
 Size: 10-3/4" dia. 6" ht.  
 Lamp: Two 13w GU24 CFL, included (non-dimmable).



P2621-09EBWB



P2621-20EBWB



P2621-30EBWB

## Low Profile

**P2602-09EBWB** Brushed Nickel  
**P2602-20EBWB** Antique Bronze  
**P2602-30EBWB** White  
 Opal glass. Universal style with quick-connect wiring.  
 Size: 10-5/8" dia., 3-7/8" ht.  
 Lamps: Two 13w GU24 CFL, included (non-dimmable).



P2602-09EBWB



P2602-20EBWB



P2602-30EBWB

## Schoolhouse

**P2620-30EBWB** White  
 Universal-style with quick-connect wiring.  
 Schoolhouse opal glass.  
 Size: 8-1/4" dia., 7-1/4" ht.  
 Lamp: One 13w GU24 CFL, included (non-dimmable).



P2620-30EBWB

*Ceiling fans are not available in Canada.*



## Schoolhouse

**P2601-20** Antique Bronze

**P2601-30** White

**P2601-80** Forged Black

Indoor/outdoor.

Opal glass

Universal-style with quick-connect wiring.

Size: 8-1/2" dia., 6-3/4" ht.

Lamp: One medium base lamp, 60w max. One medium base CFL included (non-dimmable).

Wet location listed



P2601-20



P2601-30



P2601-80

## Ashmore

**P2636-20** Antique Bronze

Indoor/outdoor. Frosted seeded glass

Universal-style with quick-connect wiring

Size: 11" dia., 8-1/4" ht.

Lamps: Two medium base lamps, 60w max. Two medium base CFL included (non-dimmable)

Damp location listed



P2636-20



Shown P2526-20 fan with P2636-20 light kit

## Low Profile

**P2611-20** Antique Bronze

**P2611-30** White

**P2611-80** Forged Black

Indoor/outdoor. Opal glass.

Universal-style with quick-connect wiring.

Size: 10-1/2" dia., 3-13/16" ht.

Lamp: Two candelabra base lamps, each 40w max., included.

Wet location listed



P2611-20



P2611-30




P2611-80

# Accessory Downrods

3/4" diameter; approximately 1" outside diameter.

Ceiling Ht.	9'-10'	10'-11'	11'-12'	12'-14'	13'-15'	14'-16'	15'-17'
Length	12"	18"	24"	36"	48"	60"	72"
Brushed Nickel	P2603-09	P2604-09	P2605-09	P2606-09	P2607-09	P2608-09	P2609-09
Antique Bronze	P2603-20	P2604-20	P2605-20	P2606-20	P2607-20	P2608-20	P2609-20
White	P2603-30	P2604-30	P2605-30	P2606-30	P2607-30	P2608-30	P2609-30
Weathered Bronze	P2603-46	P2604-46	P2605-46	P2606-46	P2607-46	P2608-46	P2609-46
Forged Bronze	P2603-77	P2604-77	P2605-77	P2606-77	P2607-77	P2608-77	P2609-77
Forged Black	P2603-80	P2604-80	P2605-80	P2606-80	P2607-80	P2608-80	P2609-80
Antique Nickel	P2603-81	P2604-81	P2605-81	P2606-81	P2607-81	P2608-81	P2609-81
Pebbles	P2603-144	P2604-144	P2605-144	P2606-144	P2607-144	P2608-144	P2609-144

## Downrod Selection Guide

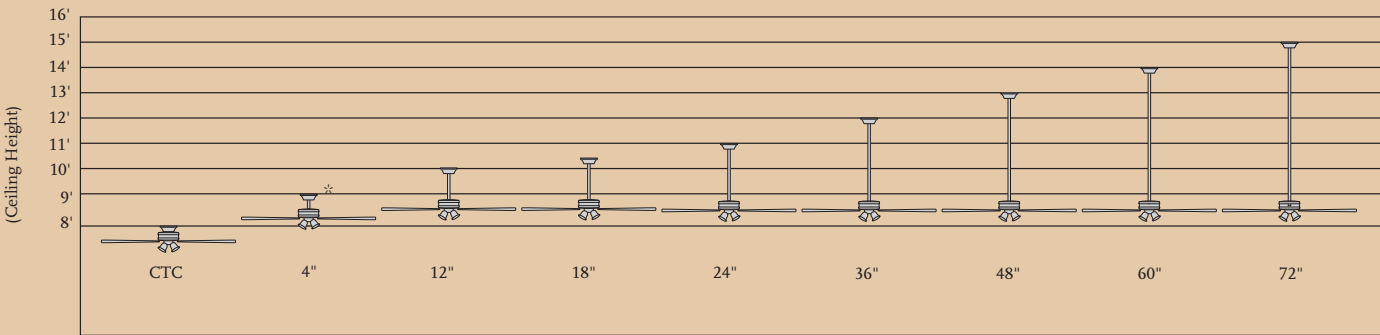

\* Average length downrod included with fans

## Fan Controls



**P2614-01** Fan/Light Remote  
Provides fan speed and dimming light control from convenient handheld remote. For single pole applications. Receiver fits in fan canopy.



**P2618-01** Fan/Light Remote  
Provides fan speed and light control from convenient handheld remote. Compatible with non-dimmable compact fluorescent lamps. For single pole applications. Receiver fits in fan canopy.



**P2613-30** White  
Four-speed fan wall control. Includes switchplate cover. Not for use with multiple fans.



**P2630-30** White  
Four-speed fan wall control with full-range light dimmer. Fits single-gang wall box; requires two circuits. Includes switchplate cover. Not for use with multiple fans.



**P2631-30** White  
Full-function wall control transmitter\*\*. Use with, or in place of, handheld remote included with fans that have a downlight. Includes switchplate cover. For use with P2514.

\*\*Receiver sold with ceiling fan

Ceiling fans are not available in Canada.



# BATH

CLEAN, CLASSIC DESIGNS INSPIRE TRENDS IN BATH AND VANITY DÉCOR. LIGHTING CAN BE USED TO CREATE A DRAMATIC, GLAMOROUS ENVIRONMENT OR A MORE SUBDUED IN-HOME SPA AMBIANCE.

WALL SCONCES, RECESSED LIGHTING, PENDANTS AND CHANDELIERS WORK TOGETHER TO CREATE A LAYERED LIGHTING DESIGN, WHICH ILLUMINATES DIFFERENT AREAS OF THE BATHROOM, WHILE CREATING AN INVITING ATMOSPHERE.





# ELINA



P2099-104

TALL TRUMPETED OPAL GLASS.  
K-9 GLASS ORB ACCENTS WITH  
A POLISHED NICKEL FINISH.



P2100-104

## ONE-LIGHT BATH

**P2099-104** Polished Nickel  
Size: 4-1/2" W., 19" ht.  
Extends 6". H/CTR 9-5/8".  
Lamp: One medium base  
lamp, 100w max.

## THREE-LIGHT BATH

**P2100-104** Polished Nickel  
Size: 23" W., 10-1/4" ht.  
Extends 6-1/4". H/CTR 4".  
Lamps: Three medium base  
lamps, 100w max.

## Chandelier

pg 12



# THE POINTE

WITH ALTERNATING CLEAR AND CHAMPAGNE  
TINTED K-9 GLASS ACCENTS, THE POINTE  
CELEBRATES THE ELEMENT OF SPARKLE.



P7134-15

## ONE-LIGHT BATH

**P7134-15** Polished Chrome  
Size: 6-1/2" W., 6-1/4" ht.  
Extends 5-7/8". H/CTR 3-1/8".  
Lamp: One candelabra base  
lamp, 60w max.

## FOUR-LIGHT BATH

**P2098-15** Polished Chrome  
Size: 24-7/8" W., 4-5/8" ht.  
Extends 6". H/CTR 2-1/4".  
Lamps: Four candelabra base  
lamps, each 60w max.



P2098-15

## Chandelier

pg 8





# CARESS

CHIC SOPHISTICATION WITH CYLINDRICAL GLASS SHADES. ETCHED GLASS DIFFUSER INSIDE CLEAR WATER GLASS FLOATS IN A TRADITIONAL PROFILE.



**ONE-LIGHT BATH**  
**P7046-104WB** Polished Nickel  
 Size: 8" W., 15" ht.  
 Extends 9-1/2". H/CTR 8-7/8".  
 Lamp: One E12 base krypton lamp, 60w max., included.

**TWO-LIGHT BATH**  
**P3076-104WB** Polished Nickel  
 Size: 18-1/2" W., 5-5/8" ht.  
 Extends 7". H/CTR 2-3/4".  
 Lamps: Two E12 base krypton lamps, each 60w max., included.

**THREE-LIGHT BATH**  
**P3077-104WB** Polished Nickel  
 Size: 26-1/2" W., 5-5/8" ht.  
 Extends 7". H/CTR 2-3/4".  
 Lamps: Three E12 base krypton lamps, each 60w max., included.

**FOUR-LIGHT BATH**  
**P3078-104WB** Polished Nickel  
 Size: 34-1/2" W., 5-5/8" ht.  
 Extends 7". H/CTR 2-3/4".  
 Lamps: Four E12 base krypton lamps, each 60w max., included.



P7046-104WB



P3076-104WB



P3077-104WB



P3078-104WB

Chandelier  
pg 22



Close-to-ceiling  
pg 302



\* P7807-01 replacement lamp recommended.

# NISSÉ

ELEGANT OVAL SHAPED, ETCHED  
OPAL GLASS SHADES, ACCENTED  
WITH CLEAR GLASS DISCS ON A  
POLISHED NICKEL FINISH.



ONE-LIGHT BATH  
**P2012-104** Polished Nickel  
Size: 5-1/4" W., 9" ht.  
Extends 5-1/4", H/CTR 6-5/8".  
Lamp: One medium base  
lamp, 100w max.

TWO-LIGHT BATH  
**P2013-104** Polished Nickel  
Size: 14-5/8" W., 9" ht.  
Extends 5-1/4", H/CTR 6-5/8".  
Lamps: Two medium base  
lamps, each 100w max.

THREE-LIGHT BATH  
**P2014-104** Polished Nickel  
Size: 24" W., 9" ht.  
Extends 5-1/4", H/CTR 6-5/8".  
Lamps: Three medium base  
lamps, each 100w max.

FOUR-LIGHT BATH  
**P2015-104** Polished Nickel  
Size: 33-1/2" W., 9" ht.  
Extends 5-1/4", H/CTR 6-5/8".  
Lamps: Four medium base  
lamps, each 100w max.



Shown: P2012-104 bath bracket



Close-to-ceiling  
pg 302



Mini-pendant  
pg 262



All fixtures on these pages mount up or down.

# ROXBURY

YOUR BATH AND VANITY AREA CAN SHINE WITH HOLLYWOOD GLAMOUR AND ROXBURY'S SLEEK FORMS. CLASSIC SILVER FINISH AND CLEAR CRYSTAL GLASS SHADES AND ACCENTS.



## ONE-LIGHT BATH

**P2724-101** Classic Silver

Size: 7" W., 8-7/8" ht.

Extends 8".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2726-101** Classic Silver

Size: 16-1/2" W., 8-5/8" ht.

Extends 7-3/4".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2727-101** Classic Silver

Size: 26" W., 8-5/8" ht.

Extends 7-3/4".

Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P2728-101** Classic Silver

Size: 35-1/2" W., 8-5/8" ht.

Extends 7-3/4".

Lamps: Four medium base lamps, each 100w max.



P2724-101



P2726-101



P2728-101

## Chandelier

pg 34



## Close-to-ceiling

pg 303



P2727-101

CLEAR, BEAUTIFUL SOLID K-9 GLASS SPHERES ACCENT THE ETCHED OPAL GLASS SHADES IN A POLISHED NICKEL FINISH.

# FORTUNE



*Shown: P2920-104 bath brackets*

## ONE-LIGHT BATH

**P7049-104WB** Polished Nickel  
Size: 5-7/8" W., 8-3/4" ht.  
Extends 7-3/4". H/CTR 4-5/8".  
Lamp: One krypton lamp, 60w max., included.

## TWO-LIGHT BATH

**P2920-104WB** Polished Nickel  
Size: 15" W., 7-3/8" ht.  
Extends 7-7/8". H/CTR 4".  
Lamps: Two krypton lamps, each 60w max., included.

## THREE-LIGHT BATH

**P2927-104WB** Polished Nickel  
Size: 23-1/2" W., 9" ht.  
Extends 7-3/4". H/CTR 4".  
Lamps: Three krypton lamps, each 60w max., included.



Close-to-ceiling

P304



Chandelier

pg 46





# Ashbury

TRADITIONAL STYLE WITH A MODERN TWIST. CURVING DETAILS HIGHLIGHTED BY SILVER RIDGE FINISH. UNIQUE DOUBLE DRUM GLASS SHADES WITH LINEN FINISH.

## ONE-LIGHT BATH

**P2885-134WB** Silver Ridge  
Size: 6" W., 9" ht.  
Extends 8". H/CTR 5-1/2".  
Lamp: One candelabra base krypton lamp, 60w max., included.



P2885-134WB

## TWO-LIGHT BATH

**P2886-134WB** Silver Ridge  
Size: 16" W., 9" ht.  
Extends 8". H/CTR 5-1/2".  
Lamps: Two candelabra base krypton lamps, each 60w max., included.



P2886-134WB

## THREE-LIGHT BATH

**P2887-134WB** Silver Ridge  
Size: 23-1/2" W., 9" ht.  
Extends 8". H/CTR 5-1/2".  
Lamps: Three candelabra base krypton lamps, each 60w max., included.



P2887-134WB

## FOUR-LIGHT BATH

**P2888-134WB** Silver Ridge  
Size: 31" W., 9" ht.  
Extends 8". H/CTR 5-1/2".  
Lamps: Four candelabra base krypton lamps, each 60w max., included.



P2888-134WB

Chandelier

pg 70



Close-to-ceiling

pg 307





# Compass

FIND YOUR FRAME OF REFERENCE WITH THE COMPASS COLLECTION. LINEAR DETAILS AND CIRCULAR K9 GLASS ACCENTS, WITH ETCHED WHITE GLASS SHADES COMPLETE THE FIXTURE.



## ONE-LIGHT BATH

**P2046-20** Antique Bronze  
Size: 4-1/2" W., 11-5/8" ht. Extends 6". H/CTR 7-5/8".  
Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2047-20** Antique Bronze  
Size: 16" W., 9-3/8" ht. Extends 6-1/4". H/CTR 5-5/8".  
Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2048-20** Antique Bronze  
Size: 24" W., 9-3/8" ht. Extends 6-1/4". H/CTR 5-5/8".  
Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P2049-20** Antique Bronze  
Size: 32" W., 9-3/8" ht. Extends 6-1/4". H/CTR 5-5/8".  
Lamps: Four medium base lamps, each 100w max.



P2049-20

Close-to-ceiling  
pg 321



Chandelier  
pg 66



*All fixtures on these pages mount up or down.*

INDULGE FEATURES CLEAR GLASS SHADES WITH ETCHED DETAILING ON THE INSIDE OF THE GLASS. A SINUOUS ANTIQUE BRONZE FINISHED FRAME HIGHLIGHTS CLEAR BOBECHES AND FINIALS.

# INDULGE



**ONE-LIGHT BATH**  
**P3101-20** Antique Bronze  
 Size: 5" W., 8-3/8" ht. Extends 7-3/8". H/CTR 5-3/4".  
 Lamp: One medium base lamp, 100w max.



**TWO-LIGHT BATH**  
**P3102-20** Antique Bronze  
 Size: 14-5/8" W., 8-3/8" ht. Extends 6-1/2". H/CTR 5-3/8".  
 Lamps: Two medium base lamps, each 60w max.

**THREE-LIGHT BATH**  
**P3103-20** Antique Bronze  
 Size: 24-1/4" W., 8-3/8" ht. Extends 6-1/2". H/CTR 5-3/8".  
 Lamps: Three medium base lamps, each 60w max.



**FOUR-LIGHT BATH**  
**P3104-20** Antique Bronze  
 Size: 33-7/8" W., 8-3/8" ht. Extends 6-1/2". H/CTR 5-3/8".  
 Lamps: Four medium base lamps, each 60w max.

**FIVE-LIGHT BATH**  
**P3105-20** Antique Bronze  
 Size: 43-1/2" W., 8-3/8" ht. Extends 6-1/2". H/CTR 5-3/8".  
 Lamps: Five medium base lamps, each 60w max.

Chandelier  
 pg 48



Close-to-ceiling  
 pg 304



# Draper

POLISHED DETAILING AND TUBULAR FORMS CONTRIBUTE TO THE SIMPLE MID-CENTURY DESIGN.

## ONE-LIGHT BATH

**P2101-20** Antique Bronze with Natural Brass accents

**P2101-104** Polished Nickel

Size: 4-1/2" W., 8" ht. Extends 4-1/8". H/CTR 4".

Lamp: One candelabra base lamp, 60w max.


## FOUR-LIGHT BATH

**P2102-20** Antique Bronze with Natural Brass accents

**P2102-104** Polished Nickel

Size: 24" W., 5-1/8" ht. Extends 4-1/8". H/CTR 2-1/4".

Lamps: Four candelabra base lamps, each 60w max.

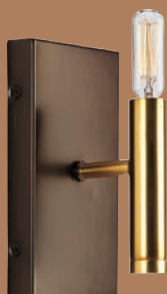


P2101-20



P2101-104



P2102-20

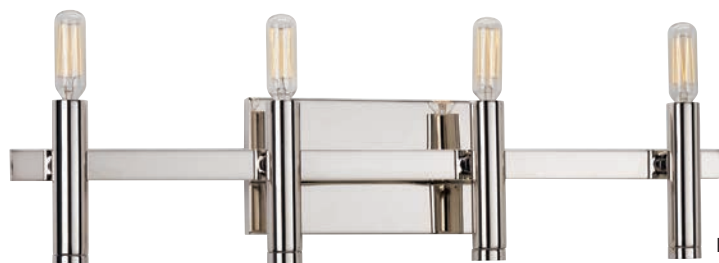

P2102-104

*All fixtures on these pages mount up or down.*

# Lucky

LUCKY'S DISTINCTIVE DESIGN EVOKES A VINTAGE FLAIR WITH FINELY CRAFTED DETAILS. LIGHT IS BEAUTIFULLY ILLUMINATED THROUGH DOUBLE PRISMATIC FROSTED GLASS SHADES.



P2115-09



P2117-09



P2115-15

## ONE-LIGHT BATH

**P2115-09** Brushed Nickel  
**P2115-15** Polished Chrome  
 Size: 5" W., 8" ht. Extends 6-5/8". H/CTR 4".  
 Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2116-09** Brushed Nickel  
**P2116-15** Polished Chrome  
 Size: 14-1/2" W., 7-5/8" ht. Extends 6-5/8". H/CTR 3-7/8".  
 Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2117-09** Brushed Nickel  
**P2117-15** Polished Chrome  
 Size: 24" W., 7-5/8" ht. Extends 6-5/8". H/CTR 3-7/8".  
 Lamps: Three medium base lamps, each 100w max.



P2116-09



P2116-15



P2118-09

## FOUR-LIGHT BATH

**P2118-09** Brushed Nickel  
**P2118-15** Polished Chrome  
 Size: 33-5/8" W., 7-5/8" ht. Extends 6-5/8". H/CTR 3-7/8".  
 Lamps: Four medium base lamps, each 100w max.



P2118-15

# Archie

A WELCOMED BLAST FROM THE PAST  
RETURNING A DESIGN GROUNDED IN  
AESTHETIC AUTHENTICITY. FINELY CRAFTED  
STRAP AND KNOB DETAILS WITH CLEAR DOUBLE  
PRISMATIC GLASS.



## ONE-LIGHT BATH

**P2989-15** Polished Chrome

**P2989-74** Venetian Bronze

**P2989-81** Antique Nickel

Size: 5-3/4" W., 8-1/4" ht.

Extends 7". H/CTR 5-1/4".

Lamp: One medium base  
lamp, 100w max.

## TWO-LIGHT BATH

**P2991-15** Polished Chrome

**P2991-74** Venetian Bronze

**P2991-81** Antique Nickel

Size: 17" W., 8-3/4" ht.

Extends 7". H/CTR 5-1/4".

Lamps: Two medium base  
lamps, each 100w max.



P2991-15



P2991-74



P2991-81



P2989-74



P2989-15



P2989-81

## Chandelier

pg 154



## Close-to-ceiling

pg 316



All fixtures on these pages mount up or down.





P2992-81



P2992-15



P2992-74



P2997-74



P2997-81



P2997-15

### THREE-LIGHT BATH

**P2992-15** Polished Chrome

**P2992-74** Venetian Bronze

**P2992-81** Antique Nickel

Size: 26-1/4" W., 8-3/4" ht.

Extends 7". H/CTR 5-1/4".

Lamps: Three medium base lamps, each 100w max.

### FOUR-LIGHT BATH

**P2997-15** Polished Chrome

**P2997-74** Venetian Bronze

**P2997-81** Antique Nickel

Size: 35-1/2" W., 8-3/4" ht.

Extends 7". H/CTR 5-1/4".

Lamps: Four medium base lamps, each 100w max.

# Revive

OFFERS A FUN TWIST ON TRADITIONAL  
STYLING. ETCHED FLUTED GLASS  
COMPLEMENTS ELEGANTLY  
EXAGGERATED ARM SHAPE.

## ONE-LIGHT BATH

**P2074-09** Brushed Nickel

**P2074-20** Antique Bronze

Size: 4-3/8" W., 9-1/4" ht.  
Extends 7-1/2". H/CTR 5-3/8".

Lamp: One medium base  
lamp, 100w max.



P2074-20

P2074-09

## TWO-LIGHT BATH

**P2075-09** Brushed Nickel

**P2075-20** Antique Bronze

Size: 13-3/8" W., 10-1/8" ht.  
Extends 7-7/8". H/CTR 7-5/8".

Lamps: Two medium base  
lamps, each 100w max.



P2075-09



P2075-20



P2076-20

## THREE-LIGHT BATH

**P2076-09** Brushed Nickel

**P2076-20** Antique Bronze

Size: 20-7/8" W., 10-1/8" ht.  
Extends 7-7/8". H/CTR 7-5/8".

Lamps: Three medium base  
lamps, each 100w max.

## FOUR-LIGHT BATH

**P2077-09** Brushed Nickel

**P2077-20** Antique Bronze

Size: 28-1/4" W., 10-1/8" ht.  
Extends 7-7/8". H/CTR 7-5/8".

Lamps: Four medium base  
lamps, each 100w max.



P2077-20



P2076-09



P2077-09

Chandelier

pg 150



# Renovations

FLOWING ARMS AND CYLINDRICAL ACCENTS FORM TO CREATE AN UNCLUTTERED VICTORIAN DESIGN. ETCHED RIBBED GLASS OFFERS A HINT OF DETAIL TO COMPLETE THE VINTAGE FEEL.



## ONE-LIGHT BATH

**P3016-77** Forged Bronze  
**P3016-81** Antique Nickel  
 Size: 6" W., 9" ht.  
 Extends 8".  
 Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2730-77** Forged Bronze  
**P2730-81** Antique Nickel  
 Size: 14" W., 8-1/4" ht.  
 Extends 8-1/8".  
 Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2731-77** Forged Bronze  
**P2731-81** Antique Nickel  
 Size: 24-1/2" W., 8-1/2" ht.  
 Extends 7-1/4".  
 Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P2732-77** Forged Bronze  
**P2732-81** Antique Nickel  
 Size: 32-1/2" W., 8-1/2" ht.  
 Extends 7-1/4".  
 Lamps: Four medium base lamps, each 100w max.

Chandelier  
 pg 146



Close-to-ceiling  
 pg 315





P3027-74



P3027-09



P3027-15



Shown: P3027-09 bath brackets

Close-to-ceiling

pg 315



All fixtures on these pages mount up or down.

[progresslighting.com](http://progresslighting.com)



# Victorian

VERSATILE VICTORIAN  
FIXTURES FEATURE A CLASSIC,  
TIMELESS ARCHITECTURE THAT  
COORDINATES WITH DELTA'S  
VICTORIAN FAUCET COLLECTION.  
WHITE OPAL GLASS.



P3028-09

## ONE-LIGHT BATH

**P3027-09** Brushed Nickel

**P3027-15** Polished Chrome

**P3027-74** Venetian Bronze

Size: 5-5/8" W., 8-1/2" ht.

Extends 7-1/4".

Lamp: One medium base  
lamp, 100w max.

## TWO-LIGHT BATH

**P3028-09** Brushed Nickel

**P3028-15** Polished Chrome

**P3028-74** Venetian Bronze

Size: 16-1/2" W., 8-1/2" ht.

Extends 7-1/4".

Lamps: Two medium base  
lamps, each 100w max.



P3028-15

## THREE-LIGHT BATH

**P3029-09** Brushed Nickel

**P3029-15** Polished Chrome

**P3029-74** Venetian Bronze

Size: 24-1/2" W., 8-1/2" ht.

Extends 7-1/4".

Lamps: Three medium base  
lamps, each 100w max.



P3029-15

## FOUR-LIGHT BATH

**P3041-09** Brushed Nickel

**P3041-15** Polished Chrome

**P3041-74** Venetian Bronze

Size: 32-1/2" W., 8-1/2" ht.

Extends 7-1/4".

Lamps: Four medium base  
lamps, each 100w max.



P3041-09



P3041-74



# Academy

A TRADITIONAL SCHOOL-HOUSE PROFILE IS UPDATED WITH LAYERED GLASS. POLISHED CHROME FINISH WITH CLEAR SEEDED OUTER GLASS SHADES AND ETCHED GLASS DIFFUSER. ANTIQUE BRONZE FINISH WITH LIGHT UMBER SEEDED GLASS SHADES AND ETCHED GLASS DIFFUSER.

## ONE-LIGHT BATH

**P2810-15WB** Polished Chrome

**P2810-20WB** Antique Bronze

Size: 5-3/8" W., 8" ht. Extends 6-7/8". H/CTR 2-3/4".

Lamp: One G9 base halogen lamp, 35w max., included.

## TWO-LIGHT BATH

**P2811-15WB** Polished Chrome

**P2811-20WB** Antique Bronze

Size: 13-7/8" W., 6-1/4" ht. Extends 6-7/8". H/CTR 2-3/4".

Lamps: Two G9 base halogen lamps, each 35w max., included.

## THREE-LIGHT BATH

**P2812-15WB** Polished Chrome

**P2812-20WB** Antique Bronze

Size: 22" W., 6-1/4" ht. Extends 6-7/8". H/CTR 2-3/4".

Lamps: Three G9 base halogen lamps, each 35w max., included.

## FOUR-LIGHT BATH

**P2813-15WB** Polished Chrome

**P2813-20WB** Antique Bronze

Size: 30-1/4" W., 6-1/4" ht. Extends 6-7/8". H/CTR 2-3/4".

Lamps: Four G9 base halogen lamps, each 35w max., included.



P2811-20WB



P2811-15WB



P2812-20WB



P2810-15WB



P2812-15WB



P2813-15WB



P2810-20WB



P2813-20WB


All fixtures on this page mount up or down.

# REIGN

CLEAR, TEXTURED, CURVED  
GLASS PANELS FLOAT IN  
FRONT OF CUSTOM ETCHED  
GLASS DIFFUSER.



P2852-20WB

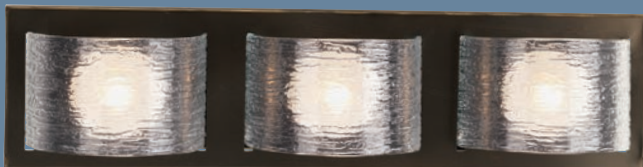

P2845-20WB



P2842-20WB




P2844-20WB

# CLICHÉ


REFLECTIONS OF THE CLEAR, PILLOW-GLASS  
PATTERN CREATE THE ILLUSION OF A FULL CIRCLE  
OF FLOATING GLASS. GLASS ARCS FLOAT IN FRONT  
OF A CUSTOM ETCHED GLASS DIFFUSER.



P2823-15WB

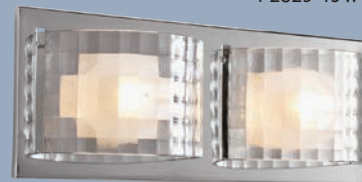

P2824-15WB

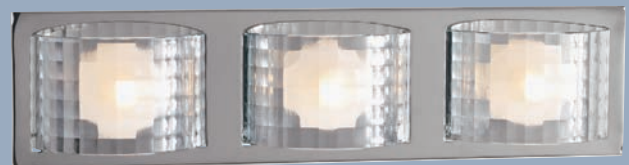

P2825-15WB



P2826-15WB

## ONE-LIGHT BATH

**P2842-20WB** Antique Bronze  
Size: 7-1/2" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamp: One G9 base halogen  
lamp, 35w max., included.

## TWO-LIGHT BATH

**P2844-20WB** Antique Bronze  
Size: 14-7/8" W., 5-1/2" ht.  
Extends 4-1/2". H/CTR 2-3/4".  
Lamps: Two G9 base halogen  
lamps, each 35w max., included.

## THREE-LIGHT BATH

**P2845-20WB** Antique Bronze  
Size: 22-1/4" W., 5-1/2" ht.  
Extends 4-1/2". H/CTR 2-3/4".  
Lamps: Three G9 base halogen  
lamps, each 35w max., included.

## FOUR-LIGHT BATH

**P2852-20WB** Antique Bronze  
Size: 29-3/4" W., 5-1/2" ht.  
Extends 4-1/2". H/CTR 2-3/4".  
Lamps: Four G9 base halogen  
lamps, each 35w max., included.

## ONE-LIGHT BATH

**P2823-15WB** Polished Chrome  
Size: 7-1/2" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamp: One G9 base halogen  
lamp, 35w max., included.

## TWO-LIGHT BATH

**P2824-15WB** Polished Chrome  
Size: 14-7/8" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamps: Two G9 base halogen  
lamps, each 35w max., included.

## THREE-LIGHT BATH

**P2825-15WB** Polished Chrome  
Size: 22-1/4" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamps: Three G9 base halogen  
lamps, each 35w max., included.

## FOUR-LIGHT BATH

**P2826-15WB** Polished Chrome  
Size: 29-3/4" W., 5-1/2" ht.  
Extends 4-1/2". H/CTR 2-3/4".  
Lamps: Four G9 base halogen  
lamps, each 35w max., included.

# Santiago

THE SANTIAGO COLLECTION OFFERS SPIRALED DETAILING AND SUBTLE TWISTS. ROASTED JAVA OR FORGED BLACK FINISH WITH JASMINE MIST GLASS.



- ONE-LIGHT BATH**  
**P2752-80** Forged Black  
**P2752-102** Roasted Java  
Size: 6-3/8" W., 11" ht. Extends 7".  
Lamp: One medium base lamp, 100w max.
- TWO-LIGHT BATH**  
**P2753-80** Forged Black  
**P2753-102** Roasted Java  
Size: 14" W., 11" ht. Extends 7".  
Lamps: Two medium base lamps, each 100w max.
- THREE-LIGHT BATH**  
**P2754-80** Forged Black  
**P2754-102** Roasted Java  
Size: 21" W., 11" ht. Extends 7".  
Lamps: Three medium base lamps, each 100w max.



Mounts in up position only.

# Melbourne

A BLEND OF RICH GOLD HIGHLIGHTS AND DARK BROWN TONES CREATE THE MELBOURNE FAMILY. SCULPTED WATERMARK GLASS OFFERS WARM, ROMANTIC FEEL.

## ONE-LIGHT BATH

**P2918-84** Espresso

Size: 6-3/8" W., 11-1/2" ht.  
Extends 9".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3022-84** Espresso

Size: 24" W., 8-1/2" ht.  
Extends 8".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3023-84** Espresso

Size: 18" W., 8-1/2" ht.  
Extends 8".

Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P3024-84** Espresso

Size: 36" W., 8-1/2" ht.  
Extends 8".

Lamps: Four medium base lamps, each 100w max.



P3022-84



P2918-84



P3023-84



P3024-84

Chandelier

pg 110



Close-to-ceiling

pg 312



All fixtures on this page mount up or down.



# Stroll

PEBBLES FINISH HIGHLIGHTS AN ARTFULLY SCROLLED FRAME WITH OPAL GLASS.

## ONE-LIGHT BATH

**P2132-144** Pebbles

Size: 5" W., 9-1/2" ht.

Extends 7-1/2". H/CTR 5-3/4".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2133-144** Pebbles

Size: 13-7/8" W., 9-1/2" ht.

Extends 7-1/2". H/CTR 5-3/4".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2134-144** Pebbles

Size: 23" W., 9-1/2" ht. Extends

7-1/2". H/CTR 5-3/4".

Lamps: Three medium base lamps, each 100w max.



P2133-144



P2132-144



P2134-144

## Chandelier

pg 84



## Close-to-ceiling

pg 309



# BLISS

K9 BEADS COMPLIMENT AN ANTIQUE BRONZE FRAME AND FLUTED, CLEAR OPTIC GLASS SHADES. MOUNT UP ONLY.

## ONE-LIGHT BATH

**P2139-20** Antique Bronze

Size: 6-3/4" W., 13" ht. Extends

9-5/8". H/CTR 6-3/4".

Lamp: One candelabra base lamp, 60w max.



P2139-20



P2141-20

## Chandelier

pg 86



All fixtures on these pages mount up or down unless otherwise noted.



# Applause

APPLAUSE IS A FINE AND HANDSOME COLLECTION THAT FEATURES NATURAL PARCHMENT GLASS WHILE CONVEYING A FUN AND POSITIVE FEEL.



P2095-20



P2096-20

## ONE-LIGHT BATH

**P2095-20** Antique Bronze

Size: 7" W., 9-1/8" ht.

Extends 7-7/8". H/CTR 5-3/4".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2096-20** Antique Bronze

Size: 16-1/4" W., 8-1/2" ht.

Extends 9". H/CTR 5-5/8".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2097-20** Antique Bronze

Size: 24" W., 8-1/2" ht.

Extends 8-7/8". H/CTR 5-3/4".

Lamps: Three medium base lamps, each 100w max.



P2097-20

Chandelier

pg 106



Close-to-ceiling

pg 309



# Legend



P2087-20



P2087-09



P2088-09



P2088-20

## ONE-LIGHT BATH

**P2087-09** Brushed Nickel

**P2087-20** Antique Bronze

Size: 7" W., 8-3/4" ht.

Extends 8". H/CTR 5-1/4".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2088-09** Brushed Nickel

**P2088-20** Antique Bronze

Size: 16-1/8" W., 7-3/8" ht.

Extends 7-3/4". H/CTR 5-1/8".

Lamps: Two medium base lamps, each 100w max.



P2090-09

*All fixtures on these pages mount up or down.*

THE CRAFTSMANSHIP OF SCULPTED GLASS IN THIS STUNNING FIXTURE DEFINES THE LEGEND COLLECTION. SMOOTH AND POLISHED ON THE OUTSIDE, YET DISPLAYING A SUBTLE, NATURE-INSPIRED PATTERN ON THE INSIDE, THIS ELEGANT FIXTURE APPEARS TO COME ALIVE WHEN ILLUMINATED.



P2089-09



P2089-20

THREE-LIGHT BATH

**P2089-09** Brushed Nickel

**P2089-20** Antique Bronze

Size: 25-1/4" W., 7-3/8" ht.

Extends 7-3/4". H/CTR 5-1/8".

Lamps: Three medium base lamps, each 100w max.

FOUR-LIGHT BATH

**P2090-09** Brushed Nickel

**P2090-20** Antique Bronze

Size: 34-1/2" W., 7-3/8" ht.

Extends 7-3/4". H/CTR 5-1/8".

Lamps: Four medium base lamps, each 100w max.



P2090-20

Chandelier

pg 132



Close-to-ceiling

pg 313



# Riverside

RIVERSIDE OFFERS A CASUAL FEEL WITH MODERN SENSIBILITY. THE HEIRLOOM FINISH COMPLEMENTS THE LINEAR FORM AND WAVE PATTERNED GLASS WITH NATURAL UNDERTONES.



## ONE-LIGHT BATH

**P3092-88** Heirloom

Size: 4-3/4" W., 12-7/8" ht.  
Extends 7-1/8".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3093-88** Heirloom

Size: 13" W., 9-1/4" ht.  
Extends 7-1/4".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3094-88** Heirloom

Size: 21-1/2" W., 9-1/4" ht.  
Extends 7-1/4".

Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P3095-88** Heirloom

Size: 29-7/8" W., 9-1/4" ht.  
Extends 7-1/4".

Lamps: Four medium base lamps, each 100w max.



P3092-88



P3093-88



P3094-88



P3095-88

Close-to-ceiling

pg 311



Chandelier

pg 116



*All fixtures on this page mount up or down.*

# Arts & Crafts

LINEAR, GEOMETRIC FORM IN  
WEATHERED BRONZE FINISH.  
LIGHT HONEY ART GLASS PANELS.



P3003-46

P3002-46  
P7138-46EB

P3004-46



P3005-46

## ONE-LIGHT BATH \*

**P3002-46** Weathered Bronze

Size: 14-1/4" W., 5" ht.

Extends 4".

Lamp: One medium base lamp, 100w max.

ADA

## THREE-LIGHT BATH

**P3003-46** Weathered Bronze

Size: 28-1/2" W., 5" ht. Extends 4".

Lamps: Three medium base lamps, each 100w max.

ADA

## FIVE-LIGHT BATH

**P3004-46** Weathered Bronze

Size: 40-1/2" W., 5" ht. Extends 4".

Lamps: Five medium base lamps, each 100w max.

ADA

## SIX-LIGHT BATH

**P3005-46** Weathered Bronze

Size: 52-1/2" W., 5" ht. Extends 4".

Lamps: Six medium base lamps, each 100w max.

ADA

## ONE-LIGHT CFL BATH \*

**P7138-46EB** Weathered Bronze

Size: 14-1/4" W., 5" ht.

Extends 4".

Lamp: One 26w GU24 CFL lamp.

ADA



\* Can be installed horizontally or vertically.  
Light honey art glass on all sides.

All fixtures other than one-light have  
etched glass on bottom and are open at  
the top.

Close-to-ceiling

pg 310



Chandelier

pg 114




These fixtures are wall mount only.



# Le Jardin

LE JARDIN IS A DRAMATIC BLEND OF TRADITIONAL CRAFTSMANSHIP AND STYLING. FORGED IRON ARMS WITH SWEEPING DETAIL SUPPORT WEATHERED SANDSTONE GLASS.

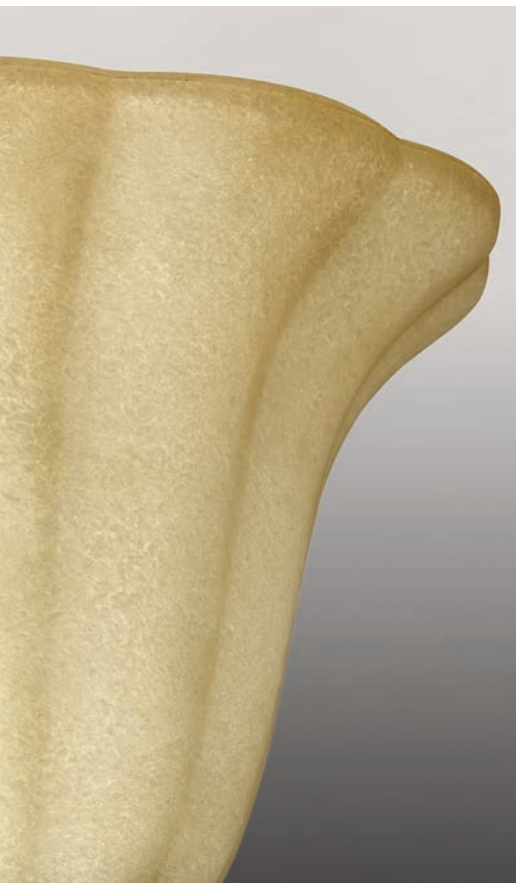

## ONE-LIGHT BATH

**P3012-84** Espresso

Size: 7" W., 11-1/2" ht.

Extends 9-1/2".

Lamp: One medium base lamp, 100w max.



P3012-84

## TWO-LIGHT BATH

**P2967-84** Espresso

Size: 16-7/8" W., 10" ht.

Extends 8-7/8".

Lamps: Two medium base lamps, each 100w max.



P2967-84

## THREE-LIGHT BATH

**P2968-84** Espresso

Size: 24-5/8" W., 10" ht.

Extends 8-7/8".

Lamps: Three medium base lamps, each 100w max.



P2968-84

## FOUR-LIGHT BATH

**P2969-84** Espresso

Size: 33-3/4" W., 10" ht.

Extends 8-7/8".

Lamps: Four medium base lamps, each 100w max.



P2969-84

Chandelier

pg 104



Close-to-ceiling

pg 311



# Torino

ELEGANT RECTANGULAR SCROLLED  
ARMS WITH CASUAL UNDERTONES.  
FORGED BRONZE WITH TEA STAINED  
GLASS OR BRUSHED NICKEL WITH  
ETCHED GLASS.



P2881-77



P2881-09

## ONE-LIGHT BATH

**P2881-09** Brushed Nickel

**P2881-77** Forged Bronze

Size: 7" W., 8-1/4" ht.

Extends 9-1/4".

Lamp: One medium base  
lamp, 100w max.

## TWO-LIGHT BATH

**P2882-09** Brushed Nickel

**P2882-77** Forged Bronze

Size: 16" W., 7-5/8" ht.

Extends 9-1/4".

Lamps: Two medium base  
lamps, each 100w max.



P2882-77



P2882-09

## THREE-LIGHT BATH

**P2883-09** Brushed Nickel

**P2883-77** Forged Bronze

Size: 25" W., 7-5/8" ht.

Extends 9-1/4".

Lamps: Three medium base  
lamps, each 100w max.



P2883-09

## FOUR-LIGHT BATH

**P2884-09** Brushed Nickel

**P2884-77** Forged Bronze

Size: 34" W., 7-5/8" ht.

Extends 9-1/4".

Lamps: Four medium base  
lamps, each 100w max.



P2884-09



P2883-77

## Chandelier

pg 128



## Close-to-ceiling

pg 314



P2884-77

# Cantata

## ONE-LIGHT BATH

**P3216-09** Brushed Nickel

**P3216-77** Forged Bronze

Size: 4-3/4" W., 12-7/8" ht.  
Extends 7-1/8".

Lamp: One medium base  
lamp, 100w max.



P3216-77



P3216-09

## TWO-LIGHT BATH

**P3222-09** Brushed Nickel

**P3222-77** Forged Bronze

Size: 13" W., 9-1/4" ht.  
Extends 7-1/4".

Lamps: Two medium base  
lamps, each 100w max.



P3222-09



P3222-77

## FOUR-LIGHT BATH

**P3249-09** Brushed Nickel

**P3249-77** Forged Bronze

Size: 29-7/8" W., 9-1/4" ht.  
Extends 7-1/4".


Lamps: Four medium base  
lamps, each 100w max.



P3248-09

*All fixtures on these pages mount up or down.*

MODERN RUSTIC STYLING FINISHED IN FORGED BRONZE WITH SEEDED TOPAZ GLASS OR BRUSHED NICKEL WITH ETCHED WHITE GLASS OFFERS A WARM, ILLUMINATED GLOW.

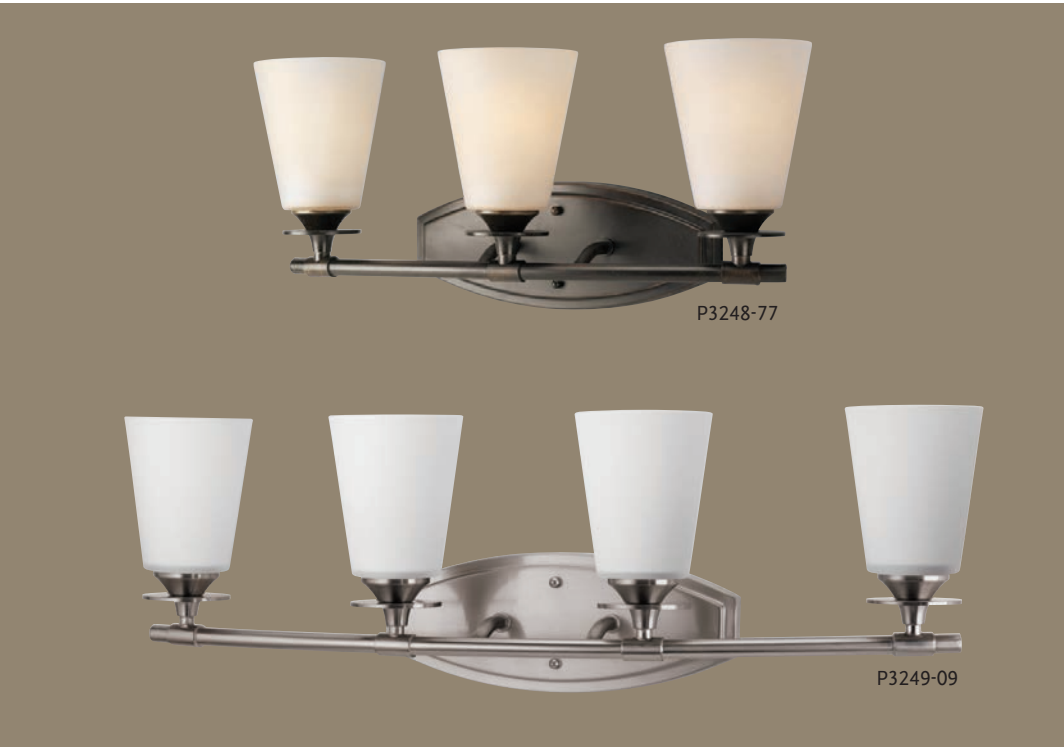

Close-to-ceiling  
pg 312



Chandelier  
pg 140



# Kensington



## ONE-LIGHT BATH

**P2783-09** Brushed Nickel

**P2783-77** Forged Bronze

Size: 6" W., 9-1/2" ht.

Extends 7".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2784-09** Brushed Nickel

**P2784-77** Forged Bronze

Size: 15" W., 9-1/2" ht.

Extends 7-5/8".

Lamps: Two medium base lamps, each 100w max.



P2783-77



P2783-09



P2784-09



P2784-77

Chandelier

pg 120



Close-to-ceiling

pg 313





KENSINGTON FEATURES SCROLLED ARMS WITH TRUMPET-SHAPED GLASS SHADES. FROSTED CARAMEL SHADES IN FORGED BRONZE FINISH AND ETCHED WHITE GLASS SHADES IN BRUSHED NICKEL.



P2786-77

#### THREE-LIGHT BATH

**P2785-09** Brushed Nickel

**P2785-77** Forged Bronze  
Size: 24-1/8" W., 9-1/2" ht.  
Extends 7-5/8".

Lamps: Three medium base lamps, each 100w max.

#### FOUR-LIGHT BATH

**P2786-09** Brushed Nickel

**P2786-77** Forged Bronze  
Size: 33" W., 9-1/2" ht.  
Extends 7-5/8".

Lamps: Four medium base lamps, each 100w max.



P2786-09



P2785-77



P2785-09

Invite



TWO-LIGHT BATH

**P2078-09** Brushed Nickel

**P2078-20** Antique Bronze

Size: 14-1/2" W., 7-3/8" ht.  
Extends 7-1/2". H/CTR 4-7/8".

Lamps: Two medium base  
lamps, each 100w max.



P2078-09

THREE-LIGHT BATH

**P2079-09** Brushed Nickel

**P2079-20** Antique Bronze

Size: 23-1/2" W., 7-3/8" ht.  
Extends 7-1/2". H/CTR 4-7/8".

Lamps: Three medium base  
lamps, each 100w max.



P2078-20



P2079-09



P2079-20



P2081-09

*All fixtures on these pages mount up or down.*

DUAL-LAYER ETCHED GLASS AND  
MYLAR DRUM SHADES ON A BRUSHED  
NICKEL OR ANTIQUE BRONZE FRAME.



P2041-09



P2041-20

#### ONE-LIGHT BATH

**P2041-09** Brushed Nickel  
**P2041-20** Antique Bronze  
Size: 6-1/2" W., 11-1/2" ht.  
Extends 8-1/4". H/CTR 3-3/4".  
Lamp: One medium base lamp,  
100w max.

#### FOUR-LIGHT BATH

**P2080-09** Brushed Nickel  
**P2080-20** Antique Bronze  
Size: 32-1/2" W., 7-3/8" ht.  
Extends 7-1/2". H/CTR 4-7/8".  
Lamps: Four medium base  
lamps, each 100w max.

#### FIVE-LIGHT BATH

**P2081-09** Brushed Nickel  
**P2081-20** Antique Bronze  
Size: 41-1/2" W., 7-3/8" ht. Extends  
7-1/2". H/CTR 4-7/8".  
Lamps: Five medium base lamps,  
each 100w max.



P2080-09



P2081-20

Chandelier  
pg 160



Close-to-ceiling  
pg 316



P2080-20

# Arch

## ONE-LIGHT BATH

**P2061-0930K9** Brushed Nickel  
Size: 7-1/4" W., 6" ht.  
Extends 3". H/CTR 3".  
Lamp: One integral 17w LED  
module included.  
ADA



P2062-0930K9



P2061-0930K9

## TWO-LIGHT BATH

**P2062-0930K9** Brushed Nickel  
Size: 14-1/2" W., 6" ht.  
Extends 3". H/CTR 3".  
Lamps: Two integral 17w LED  
modules included.  
ADA



P2063-0930K9

## THREE-LIGHT BATH

**P2063-0930K9** Brushed Nickel  
Size: 21-3/4" W., 6" ht.  
Extends 3". H/CTR 3".  
Lamps: Three integral 17w LED  
modules included.  
ADA



## LED FEATURES

- 120v AC, replaceable module
- 1211 lumens, 71.2 lumens/watt
- 3000K color temperature;  
90 CRI
- Dimmable to 10% brightness with  
ELV type dimmers
- ENERGY STAR and Title 24  
Compliant (designated models)

## FOUR-LIGHT BATH

**P2064-0930K9** Brushed Nickel  
Size: 29" W., 6" ht. Extends 3".  
H/CTR 3".  
Lamps: Four integral 17w LED  
modules included.  
ADA



P2064-0930K9

ARCH LED IS AN INNOVATIVE SERIES OF ACRYLIC LED WALL SCONCES THAT OPTIMIZES AESTHETIC APPEAL. SCREEN-PRINTED LENS ACCESSORIES – IN FABRIC LINEN OR NATURE-INSPIRED PATTERNS – CAN BE INSERTED INTO THE FIXTURES FOR A UNIQUE EFFECT. A PERFORATED METAL MESH END CAP DIFFUSES LIGHT ABOVE AND BELOW THE FIXTURE TO PROVIDE EVEN ILLUMINATION.



P2061-0930K9  
*Shown with P8932-01 shade*

ACCESSORY SHADE

**P8932-01** Fabric linen  
screen print  
Size: 6-7/8" W., 6" ht.  
Extends 2-1/4".

ACCESSORY SHADE

**P8934-01** Scroll screen print  
Size: 6-7/8" W., 6" ht.  
Extends 2-1/4".



P2062-0930K9  
*Shown with P8932-01 shades*



P2061-0930K9  
*Shown with P8934-01 shade*



P2063-0930K9  
*Shown with P8932-01 shades*



P2062-0930K9  
*Shown with P8934-01 shades*



P2064-0930K9  
*Shown with P8934-01 shades*



SOFT ACRYLIC LENS AND A BRUSHED NICKEL FINISH ARE HIGHLIGHTS OF THESE ENERGY STAR FIXTURES. FIXTURES CAN BE WALL OR CEILING MOUNTED. CAN BE INSTALLED VERTICALLY OR HORIZONTALLY.


# BALANCE

## ONE-LIGHT BATH

**P2091-0930K9** Brushed Nickel  
Size: 6" W., 5" ht.  
Extends 3". H/CTR 2-1/2".  
Lamp: One integral 9w LED module included.




P2091-0930K9

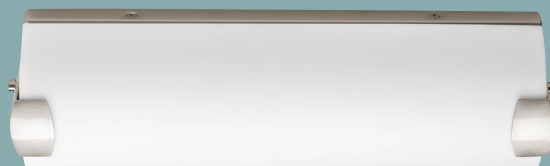

P2093-0930K9

## TWO-LIGHT BATH

**P2092-0930K9** Brushed Nickel  
Size: 11-1/2" W., 5" ht.  
Extends 3". H/CTR 2-1/2".  
Lamps: Two integral 9w LED modules included.

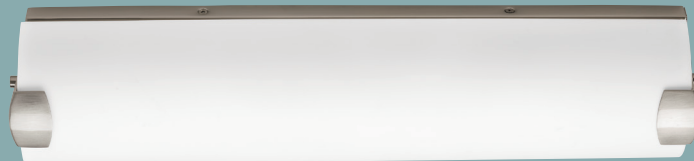

P2094-0930K9

## THREE-LIGHT BATH

**P2093-0930K9** Brushed Nickel  
Size: 16-3/4" W., 5" ht.  
Extends 3". H/CTR 2-1/2".  
Lamps: Three integral 9w LED modules included.



P2092-0930K9



P2093-0930K9



P2094-0930K9

## FOUR-LIGHT BATH

**P2094-0930K9** Brushed Nickel  
Size: 22" W., 5" ht. Extends 3".  
H/CTR 2-1/2".  
Lamps: Four integral 9w LED modules included.



## LED FEATURES

- 120v AC, replaceable module
- 623 lumens, 69.2 lumens/watt
- 3000K color temperature; 90 CRI
- Dimmable to 10% brightness with ELV type dimmers
- ENERGY STAR and Title 24 Compliant (designated models)



# HELIUM

SLEEK, FINELY RIBBED ETCHED GLASS SHADES WITH METAL STUDS SUPPORT THIS HEAVENLY STRUCTURE. CAN BE INSTALLED VERTICALLY OR HORIZONTALLY.



*Shown: P2901-09*

## TWO-LIGHT BATH

**P2901-09** Brushed Nickel  
Size: 20" W., 6" ht.  
Extends 5-3/8". H/CTR 3".  
Lamps: Two medium base  
lamps, each 75w max.

## FOUR-LIGHT BATH

**P2905-09** Brushed Nickel  
Size: 34" W., 6" ht.  
Extends 5-7/8". H/CTR 3".  
Lamps: Four medium base  
lamps, each 75w max.

Chandelier

pg 81



**P2901-09**  
*shown vertically*



**P2905-09**  
*shown vertically*




**P2905-09**  
*shown horizontally*



**P2901-09**  
*shown horizontally*

STREAMING OFFERS A CLEAN AND UNCLUTTERED DESIGN. FEATURES NO VISIBLE HARDWARE, CLEAR GLASS ETCHED INSIDE, AND A BRUSHED NICKEL FINISH. A PEEK OF LIGHT STREAMS THROUGH THE MINIMALIST FRAME.

# STREAMING

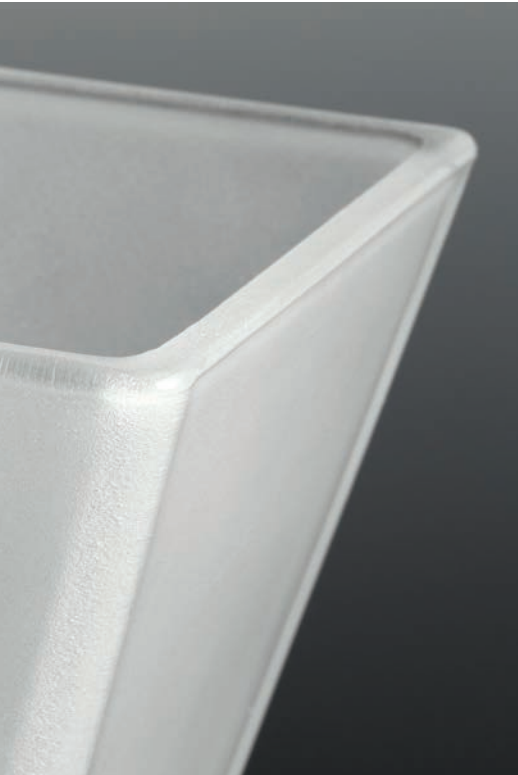

## ONE-LIGHT BATH

**P2123-09** Brushed Nickel

Size: 6" W., 5" ht.

Extends 5". H/CTR 2-1/2".

Lamp: One krypton candelabra lamp, 60w max. \*

## TWO-LIGHT BATH

**P2124-09** Brushed Nickel

Size: 14" W., 5" ht.

Extends 4-3/4". H/CTR 2-1/2".

Lamps: Two krypton candelabra lamps, each 60w max. \*

## THREE-LIGHT BATH

**P2125-09** Brushed Nickel

Size: 22" W., 5" ht.

Extends 4-3/4". H/CTR 2-1/2".

Lamps: Three krypton candelabra lamps, each 60w max. \*

## FOUR-LIGHT BATH

**P2126-09** Brushed Nickel

Size: 29-3/8" W., 5" ht.

Extends 4-3/4". H/CTR 2-1/2".

Lamps: Four krypton candelabra lamps, each 60w max. \*




P2123-09



P2124-09

\* P7807-01 lamps recommended

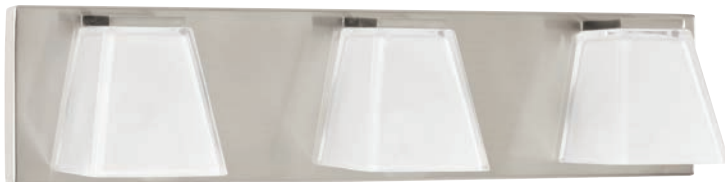

P2125-09



P2126-09

All fixtures on these pages mount up or down.

# SYNC

UPDATE YOUR BATH AND VANITY AREAS WITH A NEW COLLECTION THAT FEATURES SUPER CLEAR, POLISHED GLASS SHADES WITH LINEAR FORMS.



P2120-09



P2119-09



P2121-09

## ONE-LIGHT BATH

**P2119-09** Brushed Nickel

Size: 6" W., 5-3/4" ht.  
Extends 6-1/8". H/CTR 2-1/2".  
Lamp: One krypton E12 lamp, 60w max. \*

## TWO-LIGHT BATH

**P2120-09** Brushed Nickel

Size: 17" W., 5-3/4" ht.  
Extends 6-1/8". H/CTR 2-1/2".  
Lamps: Two krypton E12 lamps, each 60w max. \*

## THREE-LIGHT BATH

**P2121-09** Brushed Nickel

Size: 25" W., 5-3/4" ht.  
Extends 6-1/8". H/CTR 2-1/2".  
Lamps: Three krypton E12 lamps, each 60w max. \*

## FOUR-LIGHT BATH

**P2122-09** Brushed Nickel

Size: 33" W., 5-3/4" ht.  
Extends 6-1/8". H/CTR 2-1/2".  
Lamps: Four krypton E12 lamps, each 60w max. \*

\* P7807-01 lamps recommended



P2122-09

*Rizu*

CAST ANGULAR FIXTURES  
WITH WHITE GLASS SHADES.  
COORDINATES WITH DELTA'S  
RIZU FAUCET COLLECTION.



P2805-09

#### ONE-LIGHT BATH

**P2805-09** Brushed Nickel

**P2805-15** Polished Chrome

Size: 6" W., 7-1/4" ht.

Extends 6-3/4". H/CTR 3-3/4".

Lamp: One medium base lamp, 100w max.

#### TWO-LIGHT BATH

**P2806-09** Brushed Nickel

**P2806-15** Polished Chrome

Size: 13-1/2" W., 7-1/4" ht.

Extends 7". H/CTR 3-3/4".

Lamps: Two medium base lamps, each 100w max.

#### THREE-LIGHT BATH

**P2807-09** Brushed Nickel

**P2807-15** Polished Chrome

Size: 22-1/2" W., 7-1/4" ht.

Extends 7". H/CTR 3-3/4".

Lamps: Three medium base lamps, each 100w max.



P2805-15



P2806-15



P2806-09



P2807-15



P2807-09

#### FOUR-LIGHT BATH

**P2808-09** Brushed Nickel

**P2808-15** Polished Chrome

Size: 31-1/2" W., 7-1/4" ht.

Extends 7". H/CTR 3-3/4".

Lamps: Four medium base lamps, each 100w max.



P2808-15



All fixtures on these pages mount up or down.

[progresslighting.com](http://progresslighting.com)



# Synzie

DELICATE CLASSIC CHROME  
FINISHED ARMS. ETCHED WHITE  
OPAL GLASS IN AN OVAL SHAPE  
FINISH THIS ELEGANT FIXTURE.

## ONE-LIGHT BATH

**P2801-15** Polished Chrome

Size: 5-1/4" W., 10-3/8" ht.

Extends 5-5/8".

Lamp: One medium base  
lamp, 100w max.

## TWO-LIGHT BATH

**P2802-15** Polished Chrome

Size: 14-1/2" W., 11-1/8" ht.

Extends 5-5/8".

Lamps: Two medium base  
lamps, each 100w max.

## THREE-LIGHT BATH

**P2803-15** Polished Chrome

Size: 24" W., 11-1/8" ht.

Extends 5-5/8".

Lamps: Three medium base  
lamps, each 100w max.

## FOUR-LIGHT BATH

**P2804-15** Polished Chrome

Size: 33-1/4" W., 11-1/8" ht.

Extends 5-5/8".

Lamps: Four medium base  
lamps, each 100w max.



P2801-15



P2802-15



P2803-15



P2804-15

# Engage

VANITY FIXTURES FEATURE A FUN GRAPHIC REPRESENTATION AND COORDINATE WITH POPULAR BATH ACCESSORIES AND PATTERNS. AVAILABLE IN BRUSHED NICKEL OR ANTIQUE BRONZE FINISHES WITH ETCHED WHITE GLASS.

## ONE-LIGHT BATH

**P2033-09** Brushed Nickel

**P2033-20** Antique Bronze

Size: 7" W., 7" ht.

Extends 5-1/4". H/CTR 3-1/2".

Lamp: One krypton E12 lamp, 60w max.



P2033-09



P2033-20

## TWO-LIGHT BATH

**P2034-09** Brushed Nickel

**P2034-20** Antique Bronze

Size: 15" W., 7" ht.

Extends 5-1/4". H/CTR 3-1/2".

Lamps: Two krypton E12 lamps, each 60w max.



P2034-09



P2034-20

## THREE-LIGHT BATH

**P2035-09** Brushed Nickel

**P2035-20** Antique Bronze

Size: 24-1/8" W., 7" ht.

Extends 5-1/4". H/CTR 3-1/2".

Lamps: Three krypton E12 lamps, each 60w max.



P2035-09

## FOUR-LIGHT BATH

**P2036-09** Brushed Nickel

**P2036-20** Antique Bronze

Size: 33-1/8" W., 7" ht.

Extends 5-1/4". H/CTR 3-1/2".

Lamps: Four krypton E12 lamps, each 60w max.



P2035-20



P2036-20



P2036-09

*All fixtures on these pages mount up or down.*

# Arise

ARISE GREET'S YOU WITH FLOWING LINES AND OVAL ETCHED OPAL GLASS SHADES. AVAILABLE IN POLISHED CHROME OR ANTIQUE BRONZE FINISHES.

## ONE-LIGHT BATH

**P2037-15WB** Polished Chrome

**P2037-20WB** Antique Bronze

Size: 6" W., 8-1/2" ht.

Extends 4-7/8". H/CTR 4-1/4".

Lamp: One G9 base halogen lamp, 60w max., included.

## TWO-LIGHT BATH

**P2038-15WB** Polished Chrome

**P2038-20WB** Antique Bronze

Size: 17" W., 5-1/2" ht. Extends

4-3/4". H/CTR 2-1/4".

Lamps: Two G9 base halogen lamps, each 60w max., included.

## THREE-LIGHT BATH

**P2039-15WB** Polished Chrome

**P2039-20WB** Antique Bronze

Size: 26" W., 5-1/2" ht. Extends

4-3/4". H/CTR 2-1/4".

Lamps: Three G9 base halogen lamps, each 60w max., included.

## FOUR-LIGHT BATH

**P2040-15WB** Polished Chrome

**P2040-20WB** Antique Bronze

Size: 35" W., 5-3/4" ht. Extends

4-3/4". H/CTR 2-1/4".

Lamps: Four G9 base halogen lamps, each 60w max., included.



P2038-15WB



P2037-20WB



P2037-15WB



P2038-20WB



P2039-20WB



P2039-15WB



P2040-15WB



P2040-20WB

# Calven

SCULPTED PROFILE WITH BOLD EXPRESSIVE CURVES. ETCHED OPAL GLASS SHADES WITH FORGED BLACK OR BRUSHED NICKEL ARMS CREATE AN URBAN FEEL.

## ONE-LIGHT BATH

**P3209-09WB** Brushed Nickel  
**P3209-80WB** Forged Black \*  
 Size: 6-3/8" W., 11-1/2" ht.  
 Extends 7-5/8". H/CTR 6".  
 Lamp: One G9 base halogen lamp, 60w max., included.

## TWO-LIGHT BATH

**P3210-09WB** Brushed Nickel  
**P3210-80WB** Forged Black  
 Size: 18" W., 6" ht. Extends 7-7/8". H/CTR 3".  
 Lamps: Two G9 base halogen lamps, each 60w max., included.

## THREE-LIGHT BATH

**P3223-09WB** Brushed Nickel  
**P3223-80WB** Forged Black  
 Size: 25" W., 6" ht. Extends 7-7/8". H/CTR 3".  
 Lamps: Three G9 base halogen lamps, each 60w max., included.

## FOUR-LIGHT BATH

**P3236-09WB** Brushed Nickel  
**P3236-80WB** Forged Black  
 Size: 34-3/8" W., 6-1/2" ht.  
 Extends 7-7/8". H/CTR 3".  
 Lamps: Four G9 base halogen lamps, each 60w max., included.



P3209-09WB



P3210-80WB



P3209-80WB\*



P3210-09WB



P3223-09WB



P3236-80WB



P3236-09WB

Close-to-ceiling

pg 319



Chandelier

pg 166



\*P3209-80WB comes with both fabric and glass shades

All fixtures on these pages mount up or down.

progresslighting.com

# Rave

RAVE DISPLAYS A CONTEMPORARY STYLE. IDEAL FOR BATH AND VANITY AREAS. A BRUSHED NICKEL FINISH HIGHLIGHTS THE FIXTURES' SOFT CURVES AND ETCHED OPAL GLASS SHADES.

#### ONE-LIGHT BATH

**P2070-09** Brushed Nickel

Size: 7" W., 10-7/8" ht.

Extends 8-3/4". H/CTR 5-1/4".

Lamp: One krypton E12 lamp, 60w max.

#### TWO-LIGHT BATH

**P2071-09** Brushed Nickel

Size: 16-3/8" W., 7-1/8" ht.

Extends 8-7/8". H/CTR 2-3/8".

Lamps: Two krypton E12 lamps, each 60w max.

#### THREE-LIGHT BATH

**P2072-09** Brushed Nickel

Size: 26" W., 7-1/8" ht. Extends

8-3/4". H/CTR 2-3/8".

Lamps: Three krypton E12 lamps, each 60w max.

#### FOUR-LIGHT BATH

**P2073-09** Brushed Nickel

Size: 35-1/8" W., 7-1/8" ht.

Extends 8-3/4". H/CTR 2-3/8".

Lamps: Four krypton E12 lamps, each 60w max.



Close-to-ceiling

pg 319



Chandelier

pg 176



\*P7807-01 lamp recommended.



# Alexa

FEATURING A TRANSITIONAL DESIGN  
STYLE, THIS COLLECTION OFFERS THE BEST  
OF TRADITIONAL AND MODERN DETAILS.  
ETCHED LINEN AND CLEAR GLASS.




**ONE-LIGHT BATH**  
**P2959-09** Brushed Nickel  
Size: 4-1/2" W., 9-1/4" ht.  
Extends 6-1/8".  
Lamp: One medium base  
lamp, 100w max.

**TWO-LIGHT BATH**  
**P2977-09** Brushed Nickel  
Size: 13" W., 9-3/8" ht.  
Extends 6-1/8".  
Lamps: Two medium base  
lamps, each 100w max.

**THREE-LIGHT BATH**  
**P2978-09** Brushed Nickel  
Size: 22" W., 9-3/8" ht.  
Extends 6-1/8".  
Lamps: Three medium base  
lamps, each 100w max.

**FOUR-LIGHT BATH**  
**P2998-09** Brushed Nickel  
Size: 31" W., 9-1/2" ht.  
Extends 6-1/8".  
Lamps: Four medium base  
lamps, each 100w max.

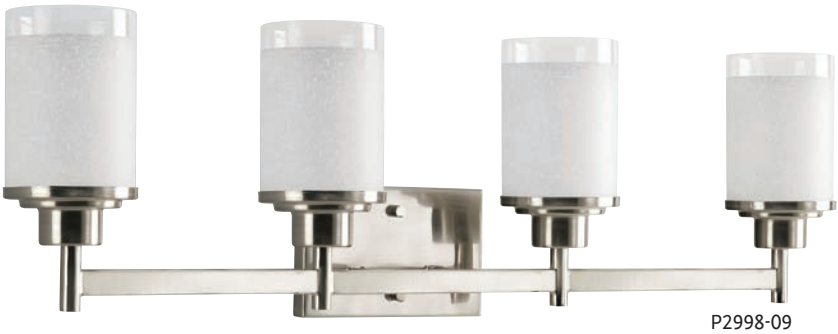

All fixtures on these pages mount up or down.

# Wisten

SIMPLE, MODERN AND ELEGANT, THE WISTEN FAMILY FEATURES A SCULPTURED LINEAR LOOK. ETCHED GLASS FOR SOFT CONTEMPORARY FEEL.



P2794-20  
P2794-20EBWB



P2796-20  
P2796-20EBWB



P2795-20



P2794-09  
P2794-09EBWB



P2797-09



P2795-09

## ONE-LIGHT BATH

**P2794-09** Brushed Nickel

**P2794-20** Antique Bronze

Size: 4-3/4" W., 8-1/4" ht.  
Extends 6-1/4".

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT CFL BATH

**P2794-09EBWB** Brushed Nickel

**P2794-20EBWB** Antique Bronze

Size: 4-3/4" W., 8-1/4" ht.  
Extends 6-1/4".

Lamp: One 13w GU24 CFL lamp included.



## TWO-LIGHT BATH

**P2795-09** Brushed Nickel

**P2795-20** Antique Bronze

Size: 12-1/2" W., 8-1/4" ht.  
Extends 6-1/4".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2796-09** Brushed Nickel

**P2796-20** Antique Bronze

Size: 21" W., 8-1/4" ht.  
Extends 6-1/4".

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CFL BATH

**P2796-09EBWB** Brushed Nickel

**P2796-20EBWB** Antique Bronze

Size: 21" W., 8-1/4" ht.  
Extends 6-1/4".

Lamps: Three 13w GU24 CFL lamps included.



## FOUR-LIGHT BATH

**P2797-09** Brushed Nickel

**P2797-20** Antique Bronze

Size: 29-1/2" W., 8-1/4" ht.  
Extends 6-1/4".

Lamps: Four medium base lamps, each 100w max.



P2796-09  
P2796-09EBWB

Chandelier

pg 170



Close-to-ceiling

pg 319



# Orbitz

ENJOY THIS CLASSIC STYLE WHEN SURROUNDED BY THE ELEGANT DETAILS OF THE ORBITZ FAMILY. OPAL GLASS SHADES FLOAT ON A CIRCULAR FRAME.



## ONE-LIGHT BATH

**P3030-09** Brushed Nickel

**P3030-20** Antique Bronze

Size: 5-1/2" W., 7-1/4" ht.  
Extends 6". H/CTR 5".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3057-09** Brushed Nickel

**P3057-20** Antique Bronze

Size: 13" W., 7-1/4" ht.  
Extends 6". H/CTR 5".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3058-09** Brushed Nickel

**P3058-20** Antique Bronze

Size: 21-3/4" W., 7-1/4" ht.  
Extends 8-1/4". H/CTR 5".

Lamps: Three medium base lamps, each 100w max.



P3030-20



P3030-09



P3057-20



P3058-09



P3057-09



P3058-20

Chandelier  
pg 162



Close-to-ceiling  
pg 317



All fixtures on these pages mount up or down.

# Bounty

RECTANGULAR SCALLOPED OPAL GLASS SITS UPON A PEDESTAL FRAME. AVAILABLE IN BRUSHED NICKEL OR ANTIQUE BRONZE FINISHES.



P2107-09



P2109-20



P2107-20



P2109-09



P2108-20



P2108-09

## ONE-LIGHT BATH

**P2107-09** Brushed Nickel

**P2107-20** Antique Bronze

Size: 6-5/8" W., 6-3/4" ht.  
Extends 6-1/4". H/CTR 3-3/8".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2108-09** Brushed Nickel

**P2108-20** Antique Bronze

Size: 15-5/8" W., 7" ht.  
Extends 6-3/8". H/CTR 4-5/8".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2109-09** Brushed Nickel

**P2109-20** Antique Bronze

Size: 24-5/8" W., 7" ht.  
Extends 6-3/8". H/CTR 4-5/8".

Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P2110-09** Brushed Nickel

**P2110-20** Antique Bronze

Size: 33-1/2" W., 7" ht.  
Extends 6-3/8". H/CTR 4-5/8".

Lamps: Four medium base lamps, each 100w max.



P2110-20

# Sahara



P2758-09



P2758-74



P2758-15

## ONE-LIGHT BATH

**P2758-09** Brushed Nickel  
**P2758-15** Polished Chrome  
**P2758-74** Venetian Bronze  
Size: 5-7/8" W., 10-7/16" ht.  
Extends 7-1/2".  
Lamp: One medium base  
lamp, 100w max.



Close-to-ceiling  
pg 318





THIS TIMELESS DESIGN WORKS WITH A VARIETY OF BATH DECORS AND COORDINATES WITH DELTA'S POPULAR LAHARA FAUCET COLLECTION. ETCHED GLASS GIVES THIS SLEEK AND DRAMATIC DESIGN A SOFTENED EDGE.



*Shown: P2758-09 one-light bath and P2760-09 three-light bath*




P2759-09



P2759-74



P2759-15

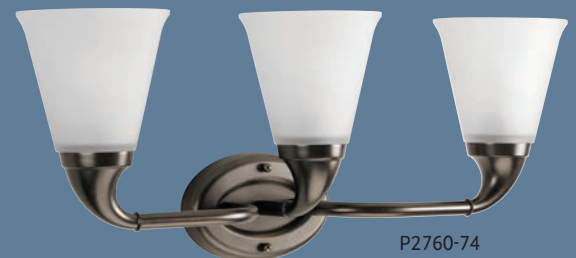

P2760-74



P2760-09



P2760-15

#### TWO-LIGHT BATH

**P2759-09** Brushed Nickel  
**P2759-15** Polished Chrome  
**P2759-74** Venetian Bronze  
 Size: 15-5/8" W., 10-3/8" ht.  
 Extends 7-1/2".  
 Lamps: Two medium base  
 lamps, each 100w max.

#### THREE-LIGHT BATH

**P2760-09** Brushed Nickel  
**P2760-15** Polished Chrome  
**P2760-74** Venetian Bronze  
 Size: 25-5/8" W., 10-3/8" ht.  
 Extends 7-1/2".  
 Lamps: Three medium base  
 lamps, each 100w max.

# Addison



P2846-74



P2846-15



P2846-09

## ONE-LIGHT BATH

**P2846-09** Brushed Nickel  
**P2846-15** Polished Chrome  
**P2846-74** Venetian Bronze  
 Size: 5-1/2" W., 9-3/8" ht.  
 Extends 6-3/4".  
 Lamp: One medium base  
 lamp, 100w max.



Shown: P2846-74 one-light bath and P2847-74 two-light bath fixtures with Delta's Addison faucets.

Close-to-ceiling  
 pg 318



INSPIRED BY THE SCALLOPED CUTS IN A SEASHELL. ADDISON FEATURES GRACEFUL, CURVED ARMS TOPPED WITH SCALLOPED GLASS SHADES WITH AN ETCHED FINISH. COORDINATES WITH DELTA'S ADDISON FAUCET COLLECTION.



P2847-15



P2847-09



P2847-74



P2848-74



P2848-09



P2848-15

#### TWO-LIGHT BATH

**P2847-09** Brushed Nickel  
**P2847-15** Polished Chrome  
**P2847-74** Venetian Bronze  
 Size: 15-7/8" W., 9" ht.  
 Extends 6-3/4".  
 Lamps: Two medium base lamps, each 100w max.

#### THREE-LIGHT BATH

**P2848-09** Brushed Nickel  
**P2848-15** Polished Chrome  
**P2848-74** Venetian Bronze  
 Size: 26" W., 9" ht.  
 Extends 6-3/4".  
 Lamps: Three medium base lamps, each 100w max.

# Glenmont



P3135-09



P3135-74



P3135-15

## ONE-LIGHT BATH

**P3135-09** Brushed Nickel  
**P3135-15** Polished Chrome  
**P3135-74** Venetian Bronze  
Size: 5-3/4" W., 8-3/4" ht.  
Extends 7-3/4".  
Lamp: One medium base  
lamp, 100w max.



Shown: P3135-74 one-light bath and P3137-74 three-light bath fixtures and Delta's Dryden faucets.



A CLEAN LINE WITH GEOMETRIC FORMS LENDS THE GLENMONT COLLECTION TO A VARIETY OF TODAY'S LIFESTYLES. COORDINATES WITH DELTA'S DRYDEN COLLECTION. ANGULAR ETCHED OPAL GLASS BLENDS WITH MINIMALIST DESIGN.



#### TWO-LIGHT BATH

**P3136-09** Brushed Nickel  
**P3136-15** Polished Chrome  
**P3136-74** Venetian Bronze  
 Size: 14-3/4" W., 8-3/4" ht.  
 Extends 7-3/4".  
 Lamps: Two medium base lamps, each 100w max.

#### THREE-LIGHT BATH

**P3137-09** Brushed Nickel  
**P3137-15** Polished Chrome  
**P3137-74** Venetian Bronze  
 Size: 21" W., 8-1/4" ht.  
 Extends 7-3/4".  
 Lamps: Three medium base lamps, each 100w max.



P3136-09



P3136-15



P3136-74



P3137-15



P3137-09



P3137-74



# North Park

CLEAN LINEAR FORMS OFFER A MODERN INTERPRETATION OF TWO BLENDED STYLES – CRAFTSMAN AND MISSION. SQUARE ETCHED GLASS SHADES GIVE NOD TO A CLASSIC FEEL.



## ONE-LIGHT BATH

**P2733-09** Brushed Nickel  
**P2733-74** Venetian Bronze  
 Size: 5-1/2" W., 10-1/8" ht.  
 Extends 7-1/8".  
 Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2738-09** Brushed Nickel  
**P2738-74** Venetian Bronze  
 Size: 14-1/4" W., 9" ht.  
 Extends 7-1/8".  
 Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P2743-09** Brushed Nickel  
**P2743-74** Venetian Bronze  
 Size: 23" W., 9" ht. Extends 7-1/8".  
 Lamps: Three medium base lamps, each 100w max.



## FOUR-LIGHT BATH

**P2745-09** Brushed Nickel  
**P2745-74** Venetian Bronze  
 Size: 32-1/8" W., 9" ht.  
 Extends 7-1/8".  
 Lamps: Four medium base lamps, each 100w max.



Chandelier  
 pg 198



Close-to-ceiling  
 pg 322



All fixtures on these pages mount up or down.

# Pavilion

THE PAVILION COLLECTION FEATURES PLAYFUL ACCENTS WITH FLOWING LINES – IDEAL FOR A VARIETY OF BATH AND VANITY AREAS. DOUBLE ARMS WITH CURLING ACCENTS. FINISHED IN BRUSHED NICKEL OR ANTIQUE BRONZE WITH ETCHED WATERMARK GLASS.



## ONE-LIGHT BATH

**P3265-09** Brushed Nickel  
**P3265-20** Antique Bronze  
 Size: 8-3/4" W., 9-1/4" ht.  
 Extends 10-1/8".  
 Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3270-09** Brushed Nickel  
**P3270-20** Antique Bronze  
 Size: 20-5/8" W., 8-7/8" ht.  
 Extends 10-1/8".  
 Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3294-09** Brushed Nickel  
**P3294-20** Antique Bronze  
 Size: 32-3/4" W., 8-7/8" ht.  
 Extends 10-1/8".  
 Lamps: Three medium base lamps, each 100w max.



P3294-09



P3294-20

Chandelier  
 pg 204



Close-to-ceiling  
 pg 321



# Fairfield

THE FAIRFIELD COLLECTION FEATURES SIMPLE, ELEGANT DETAILS. GENTLY SWEEPING ETCHED OPAL GLASS HIGHLIGHTED IN POLISHED CHROME OR BRUSHED NICKEL.



## ONE-LIGHT BATH

**P3131-09** Brushed Nickel  
**P3131-15** Polished Chrome  
 Size: 5-3/4" W., 9-3/8" ht.  
 Extends 6-3/4".  
 Lamp: One medium base lamp, 100w max.

## FOUR-LIGHT BATH

**P3134-09** Brushed Nickel  
**P3134-15** Polished Chrome  
 Size: 34-1/2" W., 9" ht.  
 Extends 6-3/4".  
 Lamps: Four medium base lamps, each 100w max.

## TWO-LIGHT BATH

**P3132-09** Brushed Nickel  
**P3132-15** Polished Chrome  
 Size: 15-1/2" W., 9" ht.  
 Extends 6-3/4".  
 Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3133-09** Brushed Nickel  
**P3133-15** Polished Chrome  
 Size: 25" W., 9" ht.  
 Extends 6-3/4".  
 Lamps: Three medium base lamps, each 100w max.



All fixtures on these pages mount up or down.

# Oasis

SIMPLE AND ELEGANT, THE OASIS VANITY COLLECTION CAN TURN ANY BATH AREA INTO A SPA-LIKE ENVIRONMENT. THE CHROME ARM AND BACK PLATE REFLECT BEVELED DETAILING PAIRED WITH SQUARE FLUTED GLASS SHADES.



P2111-15



P2112-15



P2113-15



P2114-15

#### ONE-LIGHT BATH

**P2111-15** Polished Chrome

Size: 5" W., 7-3/4" ht.

Extends 6-3/4". H/CTR 4-1/2".

Lamp: One medium base lamp, 100w max.

#### TWO-LIGHT BATH

**P2112-15** Polished Chrome

Size: 14-5/8" W., 7-3/4" ht.

Extends 6-3/4". H/CTR 5-1/2".

Lamps: Two medium base lamps, 100w max.

#### THREE-LIGHT BATH

**P2113-15** Polished Chrome

Size: 24-1/8" W., 7-3/4" ht.

Extends 6-3/4". H/CTR 5-1/2".

Lamps: Three medium base lamps, 100w max.

#### FOUR-LIGHT BATH

**P2114-15** Polished Chrome

Size: 33-3/4" W., 7-3/4" ht.

Extends 6-3/4". H/CTR 5-1/2".

Lamps: Four medium base lamps, 100w max.

JOY

ETCHED LIGHT UMBER GLASS PAIRED WITH AN ANTIQUE BRONZE FINISH OR ETCHED WHITE GLASS WITH A BRUSHED NICKEL FINISH COMPLEMENT THE FASHION FORWARD FRAME.

ONE-LIGHT BATH

**P2000-09** Brushed Nickel  
**P2000-20** Antique Bronze  
Size: 6" W., 9-1/2" ht.  
Extends 7". H/CTR 6".  
Lamp: One medium base lamp, 100w max.



P2000-09



P2000-20

TWO-LIGHT BATH

**P2001-09** Brushed Nickel  
**P2001-20** Antique Bronze  
Size: 14" W., 7-5/8" ht.  
Extends 8-1/8". H/CTR 4-1/8".  
Lamps: Two medium base lamps, each 100w max.



P2002-20



P2001-20



P2001-09

THREE-LIGHT BATH

**P2002-09** Brushed Nickel  
**P2002-20** Antique Bronze  
Size: 22" W., 7-5/8" ht.  
Extends 8-1/8". H/CTR 4-1/8".  
Lamps: Three medium base lamps, each 100w max.



P2002-09

FOUR-LIGHT BATH

**P2003-09** Brushed Nickel  
**P2003-20** Antique Bronze  
Size: 30" W., 7-5/8" ht.  
Extends 8-1/8". H/CTR 4-1/8".  
Lamps: Four medium base lamps, each 100w max.



P2003-09



P2003-20

Chandelier  
pg 184



All fixtures on these pages mount up or down.

progresslighting.com



# Savannah<sup>®</sup>

FEATURING HOSPITABLE PINEAPPLE ACCENTS AND LUXURIOUS DETAILS, THE SAVANNAH COLLECTION EVOKES A TROPICAL FEEL FOR ANY BATH AND VANITY STYLE. ANTIQUE ALABASTER GLASS WITH ROUNDED FEATURES FOR SOFT FEEL.

## ONE-LIGHT BATH

**P3204-42** Seabrook

**P3204-86** Burnished Chestnut

Size: 8-3/4" W., 9-1/4" ht.

Extends 9-1/4".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3205-42** Seabrook

**P3205-86** Burnished Chestnut

Size: 16-1/4" W., 9-1/8" ht.

Extends 9".

Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3206-42** Seabrook

**P3206-86** Burnished Chestnut

Size: 25-1/4" W., 9-1/8" ht.

Extends 9".

Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P3207-42** Seabrook

**P3207-86** Burnished Chestnut

Size: 34-1/4" W., 9-1/8" ht.

Extends 9".

Lamps: Four medium base lamps, each 100w max.



P3205-86



P3204-86



P3204-42



P3206-42



P3205-42



P3206-86



P3207-86



P3207-42

Close-to-ceiling

pg 324

Chandelier

pg 212



# Spirit



P2135-20



P2135-144



P2136-20



P2136-144



P2138-20

*All fixtures on these pages mount up or down.*

THE SPIRIT OF CRAFTSMANSHIP PREVAILS  
WITH SUBTLE FORMS. LIGHT UMBER ETCHED  
GLASS SHADES IN GALVANIZED METAL.  
PEBBLES OR ANTIQUE BRONZE FINISH.



P2137-20



P2137-144

#### ONE-LIGHT BATH

**P2135-20** Antique Bronze

**P2135-144** Pebbles

Size: 7-1/8" W., 10" ht. Extends 8-5/8". H/CTR 5".

Lamp: One medium base lamp, 100w max.

#### TWO-LIGHT BATH

**P2136-20** Antique Bronze

**P2136-144** Pebbles

Size: 17" W., 7-3/4" ht. Extends 8-1/4". H/CTR 5-1/4".

Lamps: Two medium base lamps, each 100w max.

#### THREE-LIGHT BATH

**P2137-20** Antique Bronze

**P2137-144** Pebbles

Size: 27-1/2" W., 7-3/4" ht. Extends 8-1/4". H/CTR 5-1/4".

Lamps: Three medium base lamps, each 100w max.

#### FOUR-LIGHT BATH

**P2138-20** Antique Bronze

**P2138-144** Pebbles

Size: 37-3/4" W., 7-3/4" ht. Extends 8-1/4". H/CTR 5-1/4".

Lamps: Four medium base lamps, each 100w max.



P2138-144

Close-to-ceiling

pg 323



Chandelier

pg 208



# Madison

## ONE-LIGHT BATH

**P3161-09** Brushed Nickel  
**P3161-15** Polished Chrome  
**P3161-20** Antique Bronze  
Size: 7-5/8" W., 8" ht.  
Extends 8-1/4".  
Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P3162-09** Brushed Nickel  
**P3162-15** Polished Chrome  
**P3162-20** Antique Bronze  
Size: 17-1/2" W., 8" ht.  
Extends 9".  
Lamps: Two medium base lamps, each 100w max.

## THREE-LIGHT BATH

**P3163-09** Brushed Nickel  
**P3163-15** Polished Chrome  
**P3163-20** Antique Bronze  
Size: 27-1/2" W., 8" ht.  
Extends 9".  
Lamps: Three medium base lamps, each 100w max.

## FOUR-LIGHT BATH

**P3164-09** Brushed Nickel  
**P3164-15** Polished Chrome  
**P3164-20** Antique Bronze  
Size: 37-1/2" W., 8" ht.  
Extends 9".  
Lamps: Four medium base lamps, each 100w max.



P3162-20



P3162-09



P3162-15



P3163-15



P3163-09



P3163-20

Chandelier  
pg 220



Close-to-ceiling  
pg 325



All fixtures on these pages mount up or down.

AUTHENTIC AND HANDSOME DETAILS  
REPRESENT A THROWBACK TO A SIMPLER TIME.  
ETCHED GLASS OFFERS RETRO STYLING.





# Trinity

## ONE-LIGHT BATH

**P3190-09** Brushed Nickel

**P3190-15** Polished Chrome

**P3190-20** Antique Bronze

Size: 6-1/2" W., 7-1/2" ht.

Extends 9".

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT CFL BATH

**P3190-09EBWB** Brushed Nickel

**P3190-20EBWB** Antique Bronze

Size: 6-1/2" W., 7-1/2" ht.

Extends 9".

Lamp: One 13w GU24 CFL lamp, included.



## TWO-LIGHT BATH

**P3191-09** Brushed Nickel

**P3191-15** Polished Chrome

**P3191-20** Antique Bronze

Size: 17-1/2" W., 8-1/8" ht.

Extends 7-1/2".

Lamps: Two medium base lamps, each 100w max.

## TWO-LIGHT CFL BATH

**P3191-09EBWB** Brushed Nickel

**P3191-20EBWB** Antique Bronze

Size: 17-1/2" W., 8-1/8" ht.

Extends 7-1/2".

Lamps: Two 13w GU24 CFL lamps, included.



Chandelier

pg 226



Close-to-ceiling

pg 326



P3190-15



P3190-20  
P3190-20EBWB



P3190-09  
P3190-09EBWB



P3191-09  
P3191-09EBWB



P3191-15



P3191-09  
P3191-09EBWB



P3191-20  
P3191-20EBWB

All fixtures on these pages mount up or down.

progresslighting.com

SOFT ANGLES AND CURVED LINES IN THE TRINITY COLLECTION ARE IDEAL FOR TODAY'S UNDERSTATED INTERIORS. ETCHED GLASS SHADES THAT CURVE OUT CAN BE MOUNTED UPWARD OR DOWNWARD.



#### THREE-LIGHT BATH

**P3192-09** Brushed Nickel  
**P3192-15** Polished Chrome  
**P3192-20** Antique Bronze  
 Size: 24" W., 8-1/8" ht.  
 Extends 7-1/2".  
 Lamps: Three medium base lamps, each 100w max.

#### THREE-LIGHT CFL BATH

**P3192-09EBWB** Brushed Nickel  
**P3192-20EBWB** Antique Bronze  
 Size: 24" W., 8-1/8" ht.  
 Extends 7-1/2".  
 Lamps: Three 13w GU24 CFL lamps, included.



#### FOUR-LIGHT BATH

**P3193-09** Brushed Nickel  
**P3193-15** Polished Chrome  
**P3193-20** Antique Bronze  
 Size: 33-1/4" W., 8-1/8" ht.  
 Extends 7-1/2".  
 Lamps: Four medium base lamps, each 100w max.



#### FOUR-LIGHT CFL BATH

**P3193-09EBWB** Brushed Nickel  
**P3193-20EBWB** Antique Bronze  
 Size: 33-1/4" W., 8-1/8" ht.  
 Extends 7-1/2".  
 Lamps: Four 13w GU24 CFL lamps, included.



# Bravo

## ONE-LIGHT BATH

**P2004-09** Brushed Nickel

**P2004-20** Antique Bronze

Size: 7-1/4" W., 9" ht.

Extends 8-3/4". H/CTR 4-1/2".

Lamp: One medium base lamp, 100w max.

## ONE-LIGHT CFL BATH

**P2004-09WB** Brushed Nickel

Size: 7-1/4" W., 9" ht.

Extends 8-3/4". H/CTR 4-1/2".

Lamp: One 13w GU24 CFL, included.



## TWO-LIGHT BATH

**P2005-09** Brushed Nickel

**P2005-20** Antique Bronze

Size: 17" W., 8-1/2" ht.

Extends 8-3/4". H/CTR 6-1/8".

Lamps: Two medium base lamps, each 100w max.

## TWO-LIGHT CFL BATH

**P2005-09WB** Brushed Nickel

Size: 17" W., 8-1/2" ht.

Extends 8-3/4". H/CTR 6-1/8".

Lamps: Two 13w GU24 CFL, included.



## THREE-LIGHT BATH

**P2006-09** Brushed Nickel

**P2006-20** Antique Bronze

Size: 26-3/4" W., 8-3/4" ht.

Extends 8-3/4". H/CTR 6-3/8".

Lamps: Three medium base lamps, each 100w max.

## THREE-LIGHT CFL BATH

**P2006-09WB** Brushed Nickel

Size: 26-3/4" W., 8-3/4" ht.

Extends 8-3/4". H/CTR 6-3/8".

Lamps: Three 13w GU24 CFL, included.



## FOUR-LIGHT BATH

**P2007-09** Brushed Nickel

**P2007-20** Antique Bronze

Size: 37-1/4" W., 9" ht.

Extends 8-3/4". H/CTR 6-1/2".

Lamps: Four medium base lamps, each 100w max.

## FIVE-LIGHT BATH

**P2016-09** Brushed Nickel

**P2016-20** Antique Bronze

Size: 46-1/4" W., 8-7/8" ht.

Extends 8-3/4". H/CTR 6-3/8".

Lamps: Five medium base lamps, each 100w max.



P2004-20



P2004-09  
P2004-09WB



P2005-20



P2005-09  
P2005-09WB



P2016-09




P2016-20

FREE FLOWING ARMS WITH FLUTED  
SHAPED GLASS. BRUSHED NICKEL FINISH  
HAS ETCHED GLASS. ANTIQUE BRONZE  
FEATURES ETCHED, UMBER LINEN GLASS.



P2006-09  
P2006-09WB

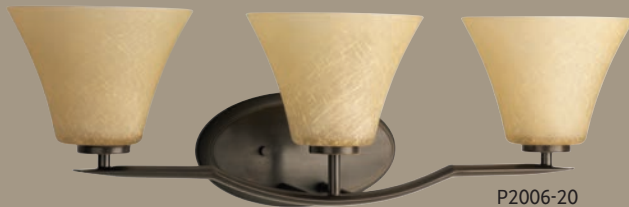

P2006-20



P2007-09



P2007-20

*All fixtures on these pages mount up or down.*

progresslighting.com

Chandelier

pg 190



# Inspire



P2018-09



P2018-20



P2018-15



P2019-20



P2019-09



P2019-15



P2021-15

Chandelier  
pg 232



Close-to-ceiling  
pg 325





UPDATED TRADITIONAL  
INSPIRATION WITH GRACIOUS,  
FLOWING OVAL ARMS  
AND ETCHED GLASS SHADES.



P2020-20



P2020-15



P2020-09

#### ONE-LIGHT BATH

**P2018-09** Brushed Nickel  
**P2018-15** Polished Chrome  
**P2018-20** Antique Bronze  
Size: 4-5/8" W., 7-1/2" ht.  
Extends 7-3/8". H/CTR 3-3/4".  
Lamp: One medium base  
lamp, 100w max.

#### TWO-LIGHT BATH

**P2019-09** Brushed Nickel  
**P2019-15** Polished Chrome  
**P2019-20** Antique Bronze  
Size: 15" W., 8-1/2" ht.  
Extends 6-7/8". H/CTR 6-1/8".  
Lamps: Two medium base  
lamps, each 100w max.

#### THREE-LIGHT BATH

**P2020-09** Brushed Nickel  
**P2020-15** Polished Chrome  
**P2020-20** Antique Bronze  
Size: 22-3/8" W., 8-1/4" ht.  
Extends 6-7/8". H/CTR 5-1/2".  
Lamps: Three medium base  
lamps, each 100w max.



P2021-20



P2021-09

#### FOUR-LIGHT BATH

**P2021-09** Brushed Nickel  
**P2021-15** Polished Chrome  
**P2021-20** Antique Bronze  
Size: 31-3/8" W., 8-1/2" ht.  
Extends 6-7/8". H/CTR 6-1/8".  
Lamps: Four medium base  
lamps, each 100w max.

# Heart

HEART WILL BRING ROMANCE TO THE VANITY, WITH FLOWING ARMS THAT GENTLY CRADLE ETCHED GLASS BOWLS.

## ONE-LIGHT BATH

**P2913-09** Brushed Nickel  
**P2913-15** Polished Chrome  
**P2913-20** Antique Bronze  
 Size: 6" W., 9-1/16" ht.  
 Extends 8". H/CTR 4-1/2".  
 Lamp: One medium base lamp, 100w max.



P2913-09



P2913-20



P2913-15

## TWO-LIGHT BATH

**P2915-09** Brushed Nickel  
**P2915-15** Polished Chrome  
**P2915-20** Antique Bronze  
 Size: 14" W., 8-3/8" ht.  
 Extends 8". H/CTR 2-1/2".  
 Lamps: Two medium base lamps, each 100w max.



P2919-09



P2915-20

## THREE-LIGHT BATH

**P2919-09** Brushed Nickel  
**P2919-15** Polished Chrome  
**P2919-20** Antique Bronze  
 Size: 22" W., 8-1/2" ht.  
 Extends 8". H/CTR 8-3/8".  
 Lamps: Three medium base lamps, each 100w max.



P2919-15



P2915-09

## FOUR-LIGHT BATH

**P2928-09** Brushed Nickel  
**P2928-15** Polished Chrome  
**P2928-20** Antique Bronze  
 Size: 29-7/8" W., 8-1/2" ht.  
 Extends 8". H/CTR 8-3/8".  
 Lamps: Four medium base lamps, each 100w max.



P2928-09



P2928-20

## Chandelier

pg 242



All fixtures on these pages mount up or down.

# Avalon

SOFT CURVES AND SOPHISTICATED  
DETAILING WITH ALABASTER STYLE  
GLASS CURVES TO COMPLEMENT  
A VARIETY OF BATH AND VANITY  
AREAS.



P3266-20

P3268-09  
P3155-09EBWBP3269-09  
P3156-09EBWBP3267-09  
P3154-09EBWB

P3267-20



P3268-20







P3269-20

## Chandelier

pg 218



Product No.	Finish	Description	Size	Lamp(s)
<b>P3266-09</b> <b>P3266-20</b>	Brushed Nickel Antique Bronze	One-light	7-3/4" W., 12" ht. Extends 8-3/4".	1 medium base, 100w max.
<b>P3267-09</b> <b>P3267-20</b>	Brushed Nickel Antique Bronze	Two-light	18" W., 7" ht. Extends 8-3/4".	2 medium base, each 100w max.
<b>P3268-09</b> <b>P3268-20</b>	Brushed Nickel Antique Bronze	Three-light	24" W., 7" ht. Extends 8-3/4".	3 medium base, each 100w max.
<b>P3269-09</b> <b>P3269-20</b>	Brushed Nickel Antique Bronze	Four-light	36" W., 7" ht. Extends 8-3/4".	4 medium base, each 100w max.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3153-09EBWB</b>	Brushed Nickel	One-light	7-3/4" W., 12" ht. Ext. 8-3/4".	One 13w GU24 CFL lamp included 
<b>P3154-09EBWB</b>	Brushed Nickel	Two-light	18" W., 7" ht. Ext. 8-3/4".	Two 13w GU24 CFL lamps included 
<b>P3155-09EBWB</b>	Brushed Nickel	Three-light	24" W., 7" ht. Ext. 8-3/4".	Three 13w GU24 CFL lamps included 
<b>P3156-09EBWB</b>	Brushed Nickel	Four-light	36" W., 7" ht. Ext. 8-3/4".	Four 13w GU24 CFL lamps included 

# Adorn

## ONE-LIGHT BATH

**P2008-09** Brushed Nickel

**P2008-15** Polished Chrome

**P2008-20** Antique Bronze

Size: 5-1/4" W., 6-3/4" ht.

Extends 7". H/CTR 3-3/8".

Lamp: One medium base lamp, 100w max.

## TWO-LIGHT BATH

**P2009-09** Brushed Nickel

**P2009-15** Polished Chrome

**P2009-20** Antique Bronze

Size: 13-1/4" W., 6-5/8" ht.

Extends 6-1/4". H/CTR 4-3/8".

Lamps: Two medium base lamps, each 100w max.



P2008-09



P2008-15



P2008-20



P2009-20



P2009-15



P2009-09



P2010-09

Chandelier

pg 184



Close-to-ceiling

pg 322



CREATED TO EASILY COORDINATE WITH MANY POPULAR FAUCET STYLES, ADORN FEATURES FLUTED ETCHED GLASS SHADES THAT MOUNT UP OR DOWN ON A CURVING FRAME.



P2010-20

#### THREE-LIGHT BATH

**P2010-09** Brushed Nickel  
**P2010-15** Polished Chrome  
**P2010-20** Antique Bronze  
 Size: 21-1/2" W., 6-5/8" ht.  
 Extends 7-1/2". H/CTR 4-3/8".  
 Lamps: Three medium base lamps, each 100w max.



P2010-15

#### FOUR-LIGHT BATH

**P2011-09** Brushed Nickel  
**P2011-15** Polished Chrome  
**P2011-20** Antique Bronze  
 Size: 28-1/4" W., 6-5/8" ht.  
 Extends 7-1/2". H/CTR 4-3/8".  
 Lamps: Four medium base lamps, each 100w max.



P2011-09



P2011-20



P2011-15



Gather

SIMPLIFIED FRAME WITH UPDATED  
STYLING AND ELEGANT ETCHED GLASS  
SHADES. ENERGY STAR FIXTURES  
AVAILABLE.



P2706-15  
P2706-15EBWB



P2706-09  
P2706-09EBWB



P2706-20  
P2706-20EBWB



P2714-09



P2714-15



P2714-20

#### ONE-LIGHT BATH

**P2706-09** Brushed Nickel

**P2706-15** Polished Chrome

**P2706-20** Antique Bronze

Size: 5" W., 7-1/2" ht.

H/CTR 2-5/8". Extends 6-1/2".

Lamp: One medium base lamp, 100w max.

#### THREE-LIGHT BATH

**P2708-09** Brushed Nickel

**P2708-15** Polished Chrome

**P2708-20** Antique Bronze

Size: 24" W., 7-1/2" ht.

H/CTR 2-1/2". Extends 6-1/2".

Lamps: Three medium base lamps, each 100w max.

#### FIVE-LIGHT BATH

**P2713-09** Brushed Nickel

**P2713-15** Polished Chrome

**P2713-20** Antique Bronze

Size: 36" W., 7-1/2" ht.

Extends 6-1/2". H/CTR 2-1/2".

Lamps: Five medium base lamps, each 100w max.

#### TWO-LIGHT BATH

**P2707-09** Brushed Nickel

**P2707-15** Polished Chrome

**P2707-20** Antique Bronze

Size: 12" W., 7-1/2" ht.

H/CTR 2-1/2". Extends 6-1/2".

Lamps: Two medium base lamps, each 100w max.

#### FOUR-LIGHT BATH

**P2709-09** Brushed Nickel

**P2709-15** Polished Chrome

**P2709-20** Antique Bronze

Size: 30" W., 7-1/2" ht.

H/CTR 2-1/2". Extends 6-1/2".

Lamps: Four medium base lamps, each 100w max.

#### SIX-LIGHT BATH

**P2714-09** Brushed Nickel

**P2714-15** Polished Chrome

**P2714-20** Antique Bronze

Size: 48" W., 7-1/2" ht.

Extends 6-1/2". H/CTR 2-1/2".

Lamps: Six medium base lamps, each 100w max.

#### Chandelier

pg 236



All fixtures on these pages mount up or down.



P2708-15  
P2708-15EBWB



P2709-15  
P2709-15EBWB



P2709-09  
P2709-09EBWB



P2713-20



P2707-20  
P2707-20EBWB



P2707-15  
P2707-15EBWB



P2707-09  
P2707-09EBWB



P2713-09

#### ONE-LIGHT CFL BATH

**P2706-09EBWB** Brushed Nickel  
**P2706-15EBWB** Polished Chrome  
**P2706-20EBWB** Antique Bronze  
Size: 5" W., 7-1/2" ht.  
Extends 6-1/2". H/CTR 2-5/8".  
Lamp: One 13w GU24 CFL,  
included.



#### TWO-LIGHT CFL BATH

**P2707-09EBWB** Brushed Nickel  
**P2707-15EBWB** Polished Chrome  
**P2707-20EBWB** Antique Bronze  
Size: 12" W., 7-1/2" ht.  
Extends 6-1/2". H/CTR 2-1/2".  
Lamps: Two 13w GU24 CFL,  
included.



#### THREE-LIGHT CFL BATH

**P2708-09EBWB** Brushed Nickel  
**P2708-15EBWB** Polished Chrome  
**P2708-20EBWB** Antique Bronze  
Size: 24" W., 7-1/2" ht.  
Extends 6-1/2". H/CTR 2-1/2".  
Lamps: Three 13w GU24 CFL,  
included.



#### FOUR-LIGHT CFL BATH

**P2709-09EBWB** Brushed Nickel  
**P2709-15EBWB** Polished Chrome  
**P2709-20EBWB** Antique Bronze  
Size: 30" W., 7-1/2" ht.  
Extends 6-1/2". H/CTR 2-1/2".  
Lamps: Four 13w GU24 CFL,  
included.



# Alabaster Glass



Product No.	Finish	Description	Size	Lamp(s)
<b>P3051-09</b> <b>P3051-20</b>	Brushed Nickel Antique Bronze	One-light	5-1/4" W., 9" ht. Extends 7-1/4".	1 medium base, 100w max.
<b>P3052-09</b> <b>P3052-20</b>	Brushed Nickel Antique Bronze	Two-light	18" W., 7-1/4" ht. Extends 7-1/4".	2 medium base, each 100w max.
<b>P3053-09</b> <b>P3053-20</b>	Brushed Nickel Antique Bronze	Three-light	24" W., 7-1/4" ht. Extends 7-1/4".	3 medium base, each 100w max.
<b>P3054-09</b> <b>P3054-20</b>	Brushed Nickel Antique Bronze	Four-light	30" W., 7-1/4" ht. Extends 7-1/4".	4 medium base, each 100w max.
<b>P3055-09</b> <b>P3055-20</b>	Brushed Nickel Antique Bronze	Five-light	36" W., 7-1/4" ht. Extends 7-1/4".	5 medium base, each 100w max.
<b>P3056-09</b> <b>P3056-20</b>	Brushed Nickel Antique Bronze	Six-light	48" W., 7-1/4" ht. Extends 7-1/4".	6 medium base, each 100w max.

Close-to-ceiling

pg 315



Product No.	Finish	Description	Size	Lamp(s)
<b>P3051-09EBWB</b>	Brushed Nickel	One-light	5-1/4" W., 9" ht. Extends 7-1/4".	1 GU24 CFL lamp, each 13w max, included
<b>P3052-09EBWB</b>	Brushed Nickel	Two-light	18" W., 7-1/4" ht. Extends 7-1/4".	2 GU24 CFL lamps, each 13w max, included
<b>P3053-09EBWB</b>	Brushed Nickel	Three-light	24" W., 7-1/4" ht. Extends 7-1/4".	3 GU24 CFL lamps, each 13w max, included
<b>P3054-09EBWB</b>	Brushed Nickel	Four-light	30" W., 7-1/4" ht. Extends 7-1/4".	4 GU24 CFL lamps, each 13w max, included

All fixtures on these pages mount up or down.

progresslighting.com

ETCHED ALABASTER GLASS WITH  
SOFT CURVES. BRUSHED NICKEL OR  
ANTIQUe BRONZE COMPLEMENT  
STEPPED BACKPLATES.



# Bedford

BRUSHED NICKEL OR ANTIQUE BRONZE FINISH HIGHLIGHT CURVED DOUBLE ARMS AND ETCHED ALABASTER GLASS.



P3367-09

# Etched Glass

WHITE ETCHED GLASS FEATURES HINT OF SOPHISTICATION. BRUSHED NICKEL FINISH HIGHLIGHTS ANGULAR ARMS.



P3369-09  
P3188-09EBWB



P3368-20



P3367-20



P3369-20

P3368-09  
P3187-09EBWB

Product No.	Finish	Description	Size	Lamp(s)
P3367-09	Brushed Nickel	One-light	5-1/4" W., 8-1/2" ht.	1 medium base,
P3367-20	Antique Bronze		Extends 7-1/4".	100w max.
P3368-09	Brushed Nickel	Two-light	14" W., 8-1/4" ht.	2 medium base,
P3368-20	Antique Bronze		Extends 6-1/4".	each 100w max.
P3369-09	Brushed Nickel	Three-light	16" W., 8-1/4" ht.	3 medium base,
P3369-20	Antique Bronze		Extends 9".	each 100w max.

Product No.	Finish	Description	Size	Ballast	Lamp(s)
P3187-09EBWB	Brushed Nickel	Two-light	14-5/8" W., 9" ht.	120V NPF electronic	2 GU24 CFL lamps, each 13w max., included
P3188-09EBWB	Brushed Nickel	Three-light	17" W., 8-5/8" ht.	120V NPF electronic	3 GU24 CFL lamps, each 13w max., included



P3302-09



P3301-09



P3303-09

Product No.	Finish	Description	Size	Lamp(s)
P3301-09	Brushed Nickel	One-light	6" W., 8-7/8" ht. Extends 7-5/8".	1 medium base, 100w max.
P3302-09	Brushed Nickel	Two-light	13-1/2" W., 8-3/4" ht. Extends 7-1/2".	2 medium base, each 100w max.
P3303-09	Brushed Nickel	Three-light	18-3/4" W., 8-7/8" ht. Extends 7-1/2".	3 medium base, each 100w max.

Close-to-ceiling

pg 326



All fixtures on these pages mount up or down.



## Opal Glass

BELL-SHAPED OPAL GLASS  
DESIGNED WITH PLAYFUL  
ANGLES IN MIND.



Product No.	Finish	Description	Size	Lamp(s)
<b>P3373-10</b>	Polished Brass	One-light	5-1/4" W., 8-1/4" ht.	1 medium base,
<b>P3373-15</b>	Polished Chrome		Extends 8".	100w max.
<b>P3374-15</b>	Polished Chrome	Two-light	14" W., 8-1/4" ht.	2 medium base,
			Extends 6-1/4".	each 100w max.
<b>P3375-10</b>	Polished Brass	Three-light	16" W., 8-1/4" ht.	3 medium base,
<b>P3375-15</b>	Polished Chrome		Extends 9".	each 100w max.
<b>P3376-15</b>	Polished Chrome	Four-light	24-1/2" W., 8-1/4" ht.	4 medium base,
			Extends 7-1/2".	each 100w max.

## Fluted Glass


RIBBED DETAILING OFFERS  
A SUBTLE TEXTURE FOR  
THE CLEAR FLUTED GLASS.



Product No.	Finish	Description	Size	Lamp(s)
<b>P3287-09</b>	Brushed Nickel	One-light	5-1/4" W., 8-1/4" ht.	1 medium base,
<b>P3287-15</b>	Polished Chrome		Extends 8".	100w max.
<b>P3287-20</b>	Antique Bronze			
<b>P3288-09</b>	Brushed Nickel	Two-light	11-3/4" W., 8-1/4" ht.	2 medium base,
<b>P3288-15</b>	Polished Chrome		Extends 8-1/4".	each 100w max.
<b>P3288-20</b>	Antique Bronze			
<b>P3289-09</b>	Brushed Nickel	Three-light	16" W., 8-1/4" ht.	3 medium base,
<b>P3289-15</b>	Polished Chrome		Extends 8-1/4".	each 100w max.
<b>P3289-20</b>	Antique Bronze			

# Deluxe Hollywood Marquee Lights

G LAMPS RECOMMENDED. WALL MOUNT ONLY.

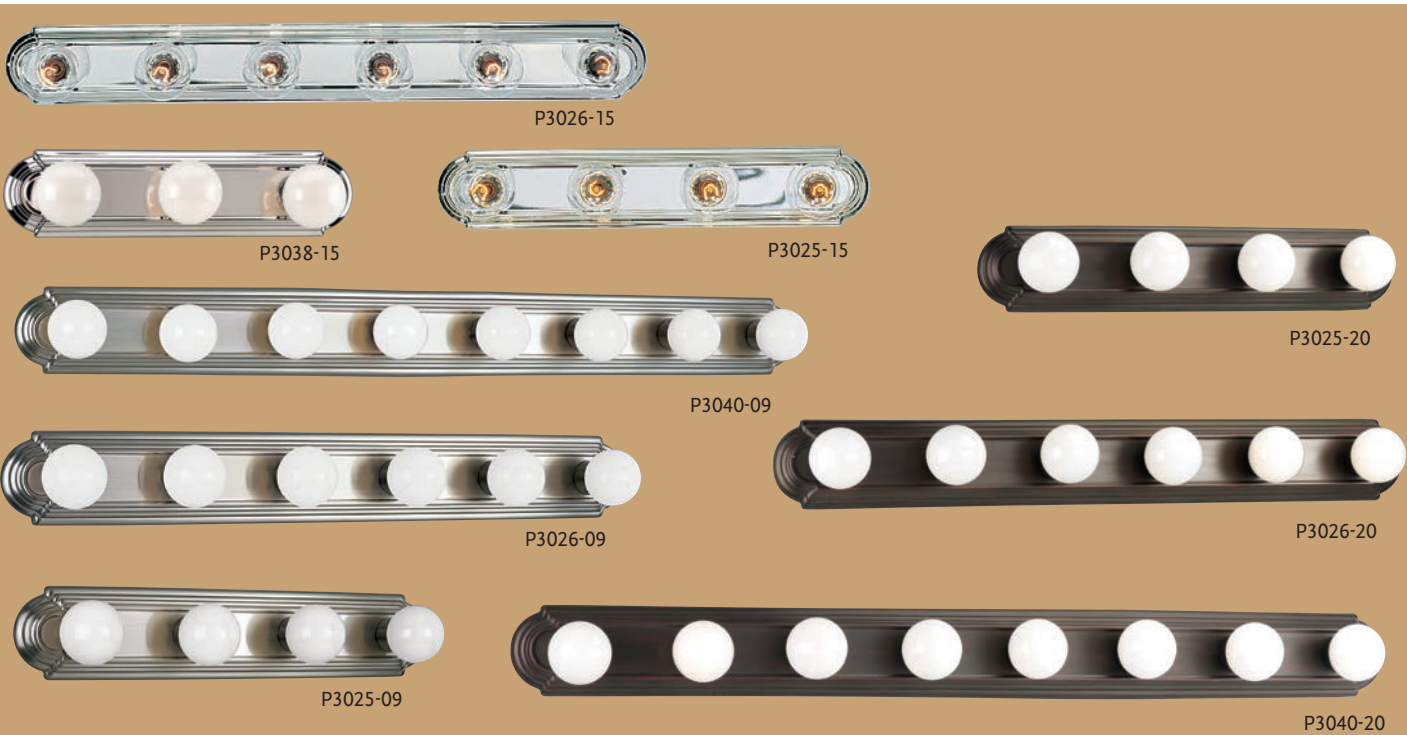

Product No.	Finish	Description	Size	Lamp(s)
P3038-15	Polished Chrome	Three-light	18" L., 4-1/2" ht.	3 medium base G-lamps, each 60w max.
P3025-09	Brushed Nickel	Four-light	24" L., 4-3/4" ht.	4 medium base G-lamps, each 60w max.
P3025-15	Polished Chrome			
P3025-20	Antique Bronze			
P3026-09	Brushed Nickel	Six-light	36" L., 4-3/4" ht.	6 medium base G-lamps, each 60w max.
P3026-15	Polished Chrome			
P3026-20	Antique Bronze			
P3040-09	Brushed Nickel	Eight-light	48" L., 4-3/4" ht.	8 medium base G-lamps, each 60w max.
P3040-15	Polished Chrome			
P3040-20	Antique Bronze			

All fixtures on these pages mount up or down.

# Deluxe Broadway Lights

SOCKETS ON 6" CENTERS. MEDIUM  
BASE G-LAMPS RECOMMENDED.  
WALL MOUNT ONLY.



P3300-15



P3335-15



P3298-15



P3298-30



P3333-15



P3333-30



P3118-15

Product No.	Finish	Description	Size	Lamp(s)
<b>P3333-15</b> <b>P3333-30</b>	Polished Chrome White	Three-light	18" L., 4-1/4" ht.	3 medium base G-lamps, each 60w max.
<b>P3298-15</b> <b>P3298-30</b>	Polished Chrome White	Four-light	24" L., 4-1/4" ht.	4 medium base G-lamps, each 60w max.
<b>P3335-15</b>	Polished Chrome	Five-light	30" L., 4-1/4" ht.	5 medium base G-lamps, each 60w max.
<b>P3299-15</b>	Polished Chrome	Six-light	36" L., 4-1/4" ht.	6 medium base G-lamps, each 60w max.
<b>P3300-15</b> <b>P3300-30</b>	Polished Chrome White	Eight-light	48" L., 4-1/4" ht.	8 medium base G-lamps, each 60w max.

# Economy Broadway Lights

SOCKETS ON 7-1/2" CENTERS. MEDIUM  
BASE G-LAMPS RECOMMENDED.  
WALL MOUNT ONLY.



P3114-15



P3115-15



P3116-15



 
P3117-15

Product No.	Finish	Description	Size	Lamp(s)
<b>P3114-15</b>	Polished Chrome	Three-light	24" L., 4-1/4" ht.	3 medium base G-lamps, each 60w max.
<b>P3115-15</b>	Polished Chrome	Four-light	30" L., 4-1/4" ht.	4 medium base G-lamps, each 60w max.
<b>P3116-15</b>	Polished Chrome	Five-light	36" L., 4-1/4" ht.	5 medium base G-lamps, each 60w max.
<b>P3117-15</b>	Polished Chrome	Six-light	48" L., 4-1/4" ht.	6 medium base G-lamps, each 60w max.
<b>P3118-15</b>	Polished Chrome	Eight-light	60" L., 4-1/4" ht.	8 medium base G-lamps, each 60w max.


## Linear Fluorescent Bath

ETCHED GLASS IN SLEEK, LINEAR FORM WITH BRUSHED NICKEL FINISH. ENERGY STAR.

Product No.	Finish	Description	Size	Lamp(s)
<b>P7211-09EB</b>	Brushed Nickel	One-light	25-5/8" W., 5-1/4" ht. Extends 4".	1-F17T8 ADA
<b>P7212-09EB</b>	Brushed Nickel	One-light	37-5/8" W., 5-1/4" ht. Extends 4".	1-F25T8 ADA



P7212-09EB

 

P7211-09EB

## Maier

CLEAN CYLINDER SILHOUETTES IN BRUSHED NICKEL WITH WHITE SATIN ACRYLIC SHADE. CAN BE INSTALLED HORIZONTALLY OR VERTICALLY. TITLE 24 COMPLIANT.

Product No.	Finish	Description	Size	Lamp(s)
<b>P7025-09EB</b>	Brushed Nickel w/white acrylic	Two-light	30" W., 5" ht. Extends 5". H/CTR 2-1/2".	2 4-pin CFL, 2G11 base lamps, 24w max.



P7025-09EB

P7025-09EB  
vertically mounted

Close-to-ceiling  
pg 344



## Contemporary Acrylic

BRUSHED NICKEL END CAPS FINISHED WITH TWIN LINEAR DETAILING. ACRYLIC DIFFUSER. WALL MOUNT ONLY. ENERGY STAR.

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7227-09EB</b>	Brushed Nickel	25-1/4" L., 5-1/4" ht. Extends 4-1/2".	120V NPF electronic	2-F17T8
<b>P7228-09EB</b>	Brushed Nickel	37-1/4" L., 5-1/4" ht. Extends 4-1/2".	120V NPF electronic	2-F25T8
<b>P7229-09EB</b>	Brushed Nickel	49-1/4" L., 5-1/4" ht. Extends 4-1/2".	120V NPF electronic	2-F32T8



P7227-09EB



P7228-09EB



P7229-09EB

All fixtures on these pages mount up or down.

# Ribbed Linear Bath

WALL OR CEILING MOUNT. WHITE RIBBED ACRYLIC DIFFUSER. CAN BE INSTALLED HORIZONTALLY OR VERTICALLY.

Product No.	Finish	Description	Size	Lamp(s)
P7218-09EB	Brushed Nickel	Two-light	25" W., 6-1/2" ht. Extends 4".	2-F17T8 ADA
P7221-09EB	Brushed Nickel	Two-light	49" W., 6-1/2" ht. Extends 4".	2-F32T8 ADA




P7218-09EB



P7221-09EB



P7218-09EB  
vertical

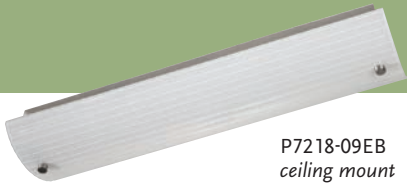

P7218-09EB  
ceiling mount


# Linear Fluorescent Bath

 WHITE ACRYLIC DIFFUSER WITH BRUSHED NICKEL ENDS. CAN BE INSTALLED HORIZONTALLY OR VERTICALLY.

Product No.	Finish	Description	Size	Lamp(s)
P7236-09	Brushed Nickel	Two-light	33-1/2" W., 4-3/8" ht. Extends 3-7/8".	2-F14T5 ADA
P7237-09	Brushed Nickel	Two-light	45-1/4" W., 4" ht. Extends 3-7/8".	2-F21T5 ADA



P7236-09



P7237-09



P7236-09  
vertical



## Metal Edge

SLEEK POLISHED CHROME METAL END CAPS. ACRYLIC DIFFUSER.  
WALL MOUNT ONLY.



P7230-15EB



 
P7231-15EB



 
P7232-15EB

## Soft Clouds


WHITE ACRYLIC DIFFUSERS CAN BE INSTALLED  
HORIZONTALLY OR VERTICALLY. PROVIDE LIGHT  
OUT AND DOWN. WALL MOUNT ONLY.






P7114-60EB



 


P7115-60EB



P7116-60EB

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7230-15EB</b>	Polished Chrome	24-1/2" L., 3-1/4" ht. Extends 5-1/4".	120/277V HPF electronic	2-F17T8 
<b>P7231-15EB</b>	Polished Chrome	36-1/2" L., 3-1/4" ht. Extends 5-1/4".	120/277V HPF electronic	2-F25T8 
<b>P7232-15EB</b>	Polished Chrome	48-1/2" L., 3-1/4" ht. Extends 5-1/4".	120/277V HPF electronic	2-F32T8 

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7114-60EB</b>	White	26-3/4" L., 6" ht. Extends 4-1/4".	120V HPF electronic	2-F17T8 
<b>P7115-60EB</b>	White	38-3/4" L., 6" ht. Extends 4-1/4".	120V HPF electronic	2-F25T8 
<b>P7116-60EB</b>	White	50-3/4" L., 6" ht. Extends 4-1/4".	120V HPF electronic	2-F32T8 

*All fixtures on these pages mount up or down.*

# Slim Profile




WHITE ACRYLIC DIFFUSER INSTALLS HORIZONTALLY OR VERTICALLY AND SNAPS IN PLACE. WHITE END CAPS. WALL MOUNT ONLY.









# Squared Bracket

EXTRUDED RIBBED WHITE ACRYLIC DIFFUSER AND WHITE END CAPS. KNOCKOUT FOR G.C.O. AND SWITCH. INSTALL HORIZONTALLY OR VERTICALLY. WALL MOUNT ONLY.



Product No.	Finish	Size	Ballast	Lamp(s)	
<b>P7094-30EB</b>	White	25-5/8" L., 4-3/4" ht. Extends 4".	120V NPF electronic	2-F17T8	ADA 
<b>P7095-30EB</b>	White	37-5/8" L., 4-3/4" ht. Extends 4".	120V NPF electronic	2-F25T8	ADA 
<b>P7096-30EB</b>	White	49-5/8" L., 4-3/4" ht. Extends 4".	120V NPF electronic	2-F32T8	ADA 

Product No.	Finish	Size	Ballast	Lamp(s)	
<b>P7128-30EB</b>	White	24-3/8" L., 4-5/8" ht. Extends 4".	120V NPF electronic	1-F17T8	
<b>P7129-30EB</b>	White	24-3/8" L., 4-5/8" ht. Extends 4".	120V HPF electronic	2-F17T8	
<b>P7130-30EB</b>	White	36-3/8" L., 4-5/8" ht. Extends 4".	120V NPF electronic	1-F25T8	
<b>P7131-30EB</b>	White	36-3/8" L., 4-5/8" ht. Extends 4".	120V HPF electronic	2-F25T8	
<b>P7132-30EB</b>	White	48-3/8" L., 4-5/8" ht. Extends 4".	120V HPF electronic	1-F32T8	
<b>P7133-30EB</b>	White	48-3/8" L., 4-5/8" ht. Extends 4".	120V HPF electronic	2-F32T8	

## White Glass

Product No.	Finish	Description	Size	Lamp(s)
<b>P3813-30</b>	White	White glass. Rotary switch on socket.	4-3/4" W., 7-1/2" ht. Extends 4".	1 medium base, 100w max. ADA



P3813-30

## Channel Glass

WHITE BATH AND VANITY GLASS FIXTURE WITH CURVED EDGES.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3111-30</b>	White Glass	Two-light. K.O. for switch and G.C.O.	13" W., 4-1/4" ht. Extends 4-1/2".	2 medium base, each 75w max.
<b>P3110-30</b>	White Glass	Four-light. K.O. for switch and G.C.O.	24" W., 4-1/4" ht. Extends 4-3/4".	4 medium base, each 75w max.



P3110-30



P3111-30

## Satin-Etched Glass

ANTIQUE BRASS WITH SATIN ETCHED GLASS OFFERS OLD WORLD FEEL.

Product No.	Finish	Description	Size	Lamp
<b>P3832-11</b>	Antique Brass	One-light	5-3/8" W., 7-7/8" ht. Extends 6".	1 medium base, 100w max.



P3832-11

## Victorian Glass

ETCHED GLASS SHADE WITH SCALLOPED EDGES AND ON-OFF SWITCH.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3830-10</b>	Polished Brass	One-light	4-1/2" W., 8-1/2" ht. Extends 4-1/2".	1 medium base, 100w max.



P3830-10

*All fixtures on these pages mount up or down.*

# Bath Fans

FANS CAN BE CEILING OR WALL MOUNTED.  
UL/CUL LISTED.

## Decorative Bath Fan

DECORATIVE BATH/  
EXHAUST FAN/LIGHT  
COMBINATION UNITS



**PV008-09STRWB**  
*(decorative bath fan  
shown complete with  
housing and fixture)*

Round decorative design with  
frosted low-profile glass.  
Smooth finish for easy cleaning.  
Damp location listed.

**PV008-09STRWB** Brushed Nickel  
70 cfm energy efficient bath fan  
with frosted glass.  
Recommended bath size 65 sq. ft.  
Sound level rating 2.0 Sones.  
4" duct adapter.  
Decorative glass/fan size:  
13" dia., 5-9/16" ht.  
Back box: 7-1/2" L., 7-5/16" W.,  
5-5/16" ht.  
Lamps: Two 13w GU24 CFL,  
2700K, included.

## EnergyStar Bath Fans



**PV020-30**

**PV020-30** Textured White  
80 cfm bath fan  
Recommended bath size 75 sq. ft.  
Sound level rating 1.0 Sones  
4" duct fitting  
Grille size: 12-3/4" sq., 7/8" deep  
Back box: 9-1/4" L., 11-5/8" W.,  
8" ht.



**PV021-30WB**

**PV021-30WB** Textured White  
80 cfm bath fan with light  
Recommended bath size 75 sq. ft.  
Sound level rating 1.0 Sones  
4" duct fitting  
Grille size: 21-5/8" sq., 4" deep  
Back box: 9-1/4" L., 11-5/8" W.,  
8" ht.  
Lamp: One 13w GU24, 2700K,  
included.

The PV020-30 and PV021-30 are Energy Star qualified bath fans that offer the best combination of energy efficiency and quiet operation. Both models are rated for 80CFM air flow at 0.1" Ps accommodating 72ft<sup>2</sup> rooms with 8' ceiling heights, and have sound ratings ≤1 sone. Air and sound ratings have been verified and listed by the Home Ventilating Institute.

Motors are encased and permanently lubricated for continuous operation. Diffusers are white and are retained by torsion springs to ensure a tight fit against the ceiling and easy installation. Both models accommodate 2" x 8" joist construction, and are shipped with bar hangers that can be adjusted for 24" joist spans.

# Bingo LED



P3737-0930K9  
shown ceiling-mounted



P3737-7430K9  
shown ceiling-mounted

Product No.	Finish	Size	Lamp(s)
<b>P3737-0930K9</b>	Brushed Nickel	45-3/4" L., 24" W.,	Five integral 17w LED modules included.
<b>P3737-7430K9</b>	Venetian Bronze	3-1/2" ht.	
<b>P3747-0930K9</b>	Brushed Nickel	24" L., 23-3/4" W.,	Three integral 17w LED modules included.
<b>P3747-7430K9</b>	Venetian Bronze	3-3/8" ht.	

## LED FEATURES

- 120v AC, replaceable module
- 1211 lumens, 71.2 lumens/watt
- 3000K color temperature;  
90 CRI
- Dimmable to 10% brightness with  
ELV type dimmers



P3747-0930K9  
shown ceiling-mounted



P3747-7430K9  
shown ceiling-mounted



SURFACE OR WALL MOUNT LED FIXTURES.  
OPAL ACRYLIC DIFFUSER WITH DISTRESSED  
MIRROR SURFACE ACCENTS.





P3756-7430K9  
*shown ceiling-mounted*



P3756-0930K9  
*shown ceiling-mounted*



*Shown: P3737-0930K9.*

Product No.	Finish	Size	Lamp(s)
P3695-0930K9	Brushed Nickel	40" L., 11-5/8" W.,	Three integral 17w LED modules included. 
P3695-7430K9	Venetian Bronze	3-3/8" ht.	
P3756-0930K9	Brushed Nickel	18-3/4" dia.,	One integral 17w LED module included. 
P3756-7430K0	Venetian Bronze	3-3/8" ht.	



P3695-0930K9  
*shown ceiling-mounted*




P3695-7430K9  
*shown ceiling-mounted*


# Surface Mount Circline Fluorescent





WHITE ACRYLIC DIFFUSER FOR KITCHEN, BATH,  
LAUNDRY, WORKSHOP OR FAMILY AREA.
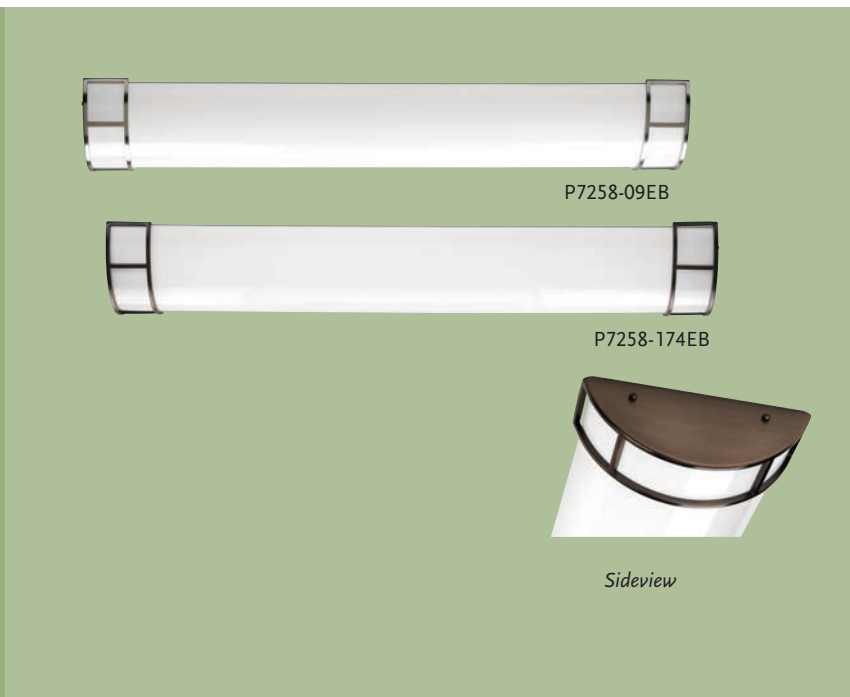
# Surface Mount Linear Fluorescent

FOR KITCHEN, BATH, LAUNDRY,  
WORKSHOP OR FAMILY AREA.




Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7258-09EB</b>	Brushed Nickel w/white acrylic	48-1/2" L.,	120V NPF	3-F32T8
<b>P7258-174EB</b>	Urban Bronze w/white acrylic	11-5/8" W., Extends 4-1/2".	electronic	

Product No.	Finish	Size	Ballast	Lamp(s)	
<b>P7249-09EBWB</b>	Brushed Nickel	10-3/8" dia.,	120V NPF	1-22w T-9	
<b>P7249-174EBWB</b>	Urban Bronze	3-1/2" ht.	electronic	included	
<b>P7250-09EBWB</b>	Brushed Nickel	17-5/8" dia.,	120V NPF	1-22w T-9 &	
<b>P7250-174EBWB</b>	Urban Bronze	4-1/2" ht.	electronic	1-32w T-9 included	
<b>P7251-09EBWB</b>	Brushed Nickel	32-1/2" L.,	120V NPF	2-32w T-9	
<b>P7251-174EBWB</b>	Urban Bronze	18" W., 4-3/8" ht.	electronic	included	
<b>P7252-09EBWB</b>	Brushed Nickel	31-1/4" dia.,	120V NPF	3-32w T-9	
<b>P7252-174EBWB</b>	Urban Bronze	6-1/2" ht.	electronic	included	


## Domes

 CONTOURED WHITE ACRYLIC DOMES WITH CURVED, TEXTURED WHITE MOLDING. FLOATS 3/4" FROM CEILING, CREATING A HALO EFFECT. DAMP LOCATION LISTED.

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7206-30EB</b>	White	59" L., 21" W. 6-5/8" ht.	120V HPF electronic	4-F32T8 



P7206-30EB



## Soft Clouds

CONTOURED, SHALLOW WHITE ACRYLIC CLOUDS. DIFFUSER SUSPENDED FROM WHITE CHASSIS.







P7279-60EB



P7285-60EB




P7278-60EB


Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7278-60EB</b>	White	28" L., 18" W., 4-5/8" ht.	120V HPF electronic	4-F17T8 
<b>P7279-60EB</b>	White	52" L., 12" W., 4-5/8" ht.	120V HPF electronic	2-F32T8 
<b>P7280-60EB</b>	White	52" L., 18" W., 4-5/8" ht.	120V HPF electronic	4-F32T8 
<b>P7285-60EB</b>	White	30-3/4" L., 27-1/4" W., 5" ht.	120V HPF electronic	2-FB32T8 

## Ribbed Linear Fluorescent

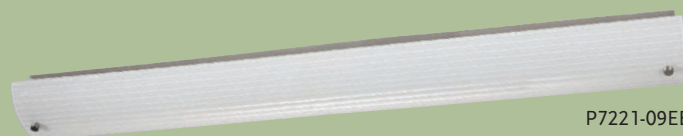

CEILING MOUNT.

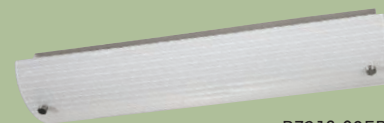

P7221-09EB



P7218-09EB

Product No.	Finish	Description	Size	Ballast	Lamp(s)
<b>P7218-09EB</b>	Brushed Nickel	Two-light	25" W., 4" ht. Extends 6-1/4"	120V NPF electronic	2-F17T8 
<b>P7221-09EB</b>	Brushed Nickel	Two-light	49" W., 4" ht. Extends 6-1/4"	120V NPF electronic	2-F32T8 

## Emergency Battery Pack



P8698-01

### P8698-01 Emergency Battery Pack

Emergency fluorescent ballast accessory for remote mounting.

Operates 2' - 4' single bi-pin T8 through T12 fluorescent lamps, 17W to 40W.

Includes test switch and charge indicator accessory kit.

Emergency Operating Time: 90 minutes

Input Voltage: 120/277V, 60Hz


Initial Illumination: (1) lamp up to 700 Lumens

Operating temp: 0° to 55° C

UL and CUL Listed

## Wood Frame



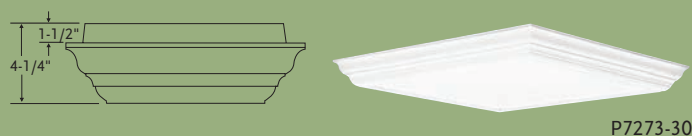

SQUARE WOOD FRAME SUSPENDED FROM SURFACE-MOUNTED WHITE CHASSIS. WHITE ACRYLIC DIFFUSER.



P7273-30



P7275-30

Trim No.	Finish	Chassis	Size	Ballast	Lamp(s)
<b>P7273-30</b>	White	<b>P7213-30EB</b>	26-1/2" L., 26" W., 4-1/4" ht.	120V HPF electronic	2-FB32T8 
<b>P7274-30</b>	White	<b>P7214-30EB</b>	50-1/2" L., 15" W., 4-1/4" ht.	120V HPF electronic	2-F32T8 
<b>P7275-30</b>	White	<b>P7215-30EB</b>	50-1/2" L., 18" W., 4-3/4" ht.	120V HPF electronic	4-F32T8 
<b>P7276-30</b>	White	<b>P7216-30EB</b>	50-1/2" L., 26-1/2" W., 4-1/4" ht.	120V HPF electronic	4-F32T8 

## Wrap-Arounds




CLEAR EXTRUDED PRISMATIC ACRYLIC DIFFUSER, SQUARED WHITE END CAPS AND WHITE CHASSIS. GENERAL UTILITY FLUORESCENTS FOR INDIVIDUAL OR CONTINUOUS RUN CEILING MOUNTING.



P7183-30EB






P7186-30EB

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7183-30EB</b>	White	24" L., 7-3/4" W., 3" ht.	120V NPF electronic	2-F17T8 
<b>P7186-30EB</b>	White	48" L., 7-3/4" W., 3" ht.	120V HPF electronic	2-F32T8 
<b>P7196-30EB</b>	White	48" L., 15-5/8" W., 3" ht.	120V HPF electronic	4-F32T8 

## White Finish

WHITE VINYL ON METAL. WHITE ACRYLIC DIFFUSER SUSPENDED FROM SURFACE MOUNTED WHITE CHASSIS.

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7262-30EB</b>	White	24-1/2" L., 24-1/2" W., 4-1/2" ht.	120V HPF electronic	2-FB32T8 
<b>P7263-30EB</b>	White	49" L., 12-1/2" W., 4-1/2" ht.	120V HPF electronic	2-F32T8 
<b>P7264-30EB</b>	White	49" L., 16" W., 4-1/2" ht.	120V HPF electronic	4-F32T8 



P7263-30EB



P7262-30EB

## Closet Lights

WHITE ACRYLIC DIFFUSER WITH WHITE METAL HOUSING. CAN BE MOUNTED DIRECTLY TO JUNCTION BOX.



P7201-30WB

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7201-30WB</b>	White	18-1/4" L., 4" W., 1-3/8" ht.	120V NPF magnetic	1-F15T8 included



## Slim Line Wrap

ACRYLIC DIFFUSER WITH WHITE END CAPS.  
FOR KITCHENS, LAUNDRY ROOMS AND WORK AREAS.



P7154-30STR



P7137-30STR

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7137-30STR</b>	White	26-3/4" L., 6-1/4" W., 2-1/2" ht.	120V NPF electronic	2-F17T8
<b>P7154-30STR</b>	White	38-3/4" L., 6-1/4" W., 2-1/2" ht.	120V NPF electronic	2-F25T8
<b>P7189-30STR</b>	White	50-5/8" L., 6-1/4" W., 2-1/2" ht.	120V NPF electronic	2-F32T8



## Fluorescent Strips

T-8 FLUORESCENT STRIPS FOR UTILITY,  
CLOSET, GARAGE OR GENERAL LIGHTING.

Product No.	Finish	Size	Ballast	Lamp(s)
<b>P7265-30EB</b>	White	24" L., 3" W. Extends 3-1/8".	120V NPF electronic	1-F17T8
<b>P7266-30EB</b>	White	24-1/4" L., 3" W. Extends 3-1/8".	120V NPF electronic	2-F17T8
<b>P7267-30EB</b>	White	48" L., 3" W. Extends 3-1/8".	120V NPF electronic	1-F32T8
<b>P7268-30EB</b>	White	48" L., 3" W. Extends 3-1/8".	120V NPF electronic	2-F32T8



P7265-30EB



P7266-30EB



P7267-30EB



P7268-30EB

See page 469 for emergency battery pack



## LED Strips | Undercabinet Systems



### HOW TO USE

MOUNT SECURELY UNDER CABINETS WITH  
HIDE-A-LITE'S DURABLE ADHESIVE BACKING

### FOLLOW FOUR SIMPLE STEPS:

Choose a tape length

Select LED tape strip length. Hide-a-Lite offers 2"L, 12"L and 60"L size options. Mounting clips are included. (Install in rows of two or more to aid in task lighting or enhance lighting effects.)

Select Transformer

Progress Lighting's 24V transformer emits no audible noise, is moisture and shock resistant and employs automatically resetting short circuit protection. Also it is dimmable with an electronic low-voltage dimmer.

Use connectors to customize project

Connector cords and L-connectors can increase length and help navigate corners. Choose between a variety of connector cords to allow end-to-end connection.

Complete the look

Select end caps to finish and complete the look.

### 1 Choose a Tape Length



**P7040-30** White  
24V LED 12" 3000K tape light.  
Size: 3/8" W., 12" L., 1/8" ht.

**P7041-30** White  
24V LED 5' 3000K tape light.  
Size: 3/8" W., 60" L., 1/8" ht.

**P7042-30** White  
24V LED 2" 3000K tape light.  
Size: 3/8" W., 2" L., 1/8" ht.



- 85CRI, 3000K color temp. 40,000 hr. life
- 120 lumens per foot and consumes 3 watts per foot
- Field cuttable at every 2" to end of run.
- CETL listed damp location

### 2 Select Transformer

**P8683-31** Black  
24V 100w LED tape  
transformer  
Size: 5" L., 2" W., 1" ht.



- Hard wire 100w 24V zero load transformer
- High power factor >95%
- Maximum operating temperature -20° C to +90° C
- Electronic circuit design with short circuit and overload protection with auto shut down/reset
- Sound rated A, emits no audible noise
- Integrated 5-pin female connector for direct connection to the 1st LED strip in the run

HIDE-A-LITE 4 LED TAPE LIGHTING FOR UNDER CABINETS AND COVES: ADD AESTHETIC, ENERGY EFFICIENT AND FUNCTIONAL LIGHTING\* IN THE MOST USED AREAS OF YOUR HOME: KITCHENS, UTILITY ROOMS, LAUNDRY ROOMS, WET BARS, DISPLAY CASES



#### MOUNTING CLIPS / END CAPS

Additional mounting clips and end caps for Hide-a-Lite 4 LED tape system

##### P8752-01

Pack of 10 clips/screws for straight runs for added support (2 clips per foot recommended)  
Size: 1/2" L, 1/2" W.

##### P8731-30 Black

End caps to terminate run of LED tape. Includes one cut end cap and one male end cap. For use when tape has been cut at end of run.  
Size: 1/2" L, 1/2" W.



## Additional System Components

### CONNECTOR CORDS

(optional for joining LED tape between cabinets)

#### P8705-31 Black

8' Connector cord to connect tape sections (P7040, P7041 and P7042)  
Size: 96" L, 1/2" W, 3/16" ht.

#### P8732-31 Black

6" Connector cord to connect tape sections (P7040, P7041 and P7042)  
Size: 6" L, 1/2" W, 3/16" ht.

#### P8747-31 Black

2" Connector cord to connect tape sections (P7040, P7041 and P7042)  
Size: 2" L, 1/2" W, 3/16" ht.

#### P8749-31 Black

12" Connector cord to connect tape sections (P7040, P7041 and P7042)  
Size: 12" L, 1/2" W, 3/16" ht.

#### P8750-31 Black

18" Connector cord to connect tape sections (P7040, P7041 and P7042)  
Size: 18" L, 1/2" W, 3/16" ht.



### L CONNECTOR

#### P8711-31 Black

90° connector for connecting sections of tape (P7040, P7041 and P7042) on corners.  
Size: 1-5/16" L, 1-3/8" W.



### Y CONNECTOR

#### P8744-31 Black

Three-way Y connector for Hide-a-Lite 4 LED tape (P7040, P7041 and P7042) with 1 male and 2 female connection points.  
Size: 4-1/4" dia., 3/16" ht.



# HIDE a LITE 3

PROGRESS **LED**

## 120V AC LED Puck

Wet location listed.

**ELECTRICAL**  
120V AC linkable LED puck.

**LAMPING**  
Long life LED's 50,000 hours, 70% lumen maintenance. 3000k color temperature, 85+ CRI.

### CONSTRUCTION

Die cast enclosure. V5 rated cover and frosted lens.

### LINKABLE

This system can be powered from a single location using the P8740 direct-wire junction box using HAL3 linking cables (P8733, P8737, P8738, P8739). The fixtures can be linked together to form a continuous row of illumination.

### DIMMABLE

Smooth and continuous dimming using most incandescent dimmers (Note: Reference dimmer manufacturer's minimum load requirements.)

### TWO-LIGHT LED PUCK

**P7510-30** White


120V LED puck.

Size: 3-1/4" dia., 15/16" ht.

Lamps: 4w LED array.



P7510-30

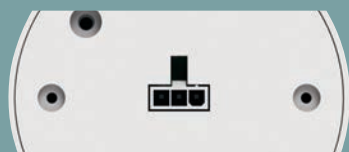

*Quick connect locations on two sides and the top.*



## Linking Cables for HAL 3

**P8733-20** Antique Bronze

**P8733-30** White

12" Undercabinet fixture linking cable.

Size: 3/4" W., 3/8" ht. 12" L.



P8733-30

**P8735-20** Antique Bronze

**P8735-30** White

6" Undercabinet fixture linking cable.

Size: 3/4" W., 3/8" ht. 6" L.



P8735-30

**P8737-20** Antique Bronze

**P8737-30** White

18" Undercabinet fixture linking cable.

Size: 3/4" W., 3/8" ht. 18" L.



P8737-30

**P8738-20** Antique Bronze

**P8738-30** White

24" Undercabinet fixture linking cable.

Size: 3/4" W., 3/8" ht. 24" L.



P8738-30



## 120V LED Strips | Undercabinet Systems

Direct Wire and Linkable, with long-life LED's

### ELECTRICAL

Each fixture includes 120V dimmable electronic power supplies rated for long-life continuous use. An on/off rocker switch is included.

### LAMPING

70% lumen maintenance over 35,000 hours. 3000K, 80+ CRI.

### CONSTRUCTION

Extruded aluminum frame, polycarbonate end plates match frame finish. Tempered micro-prismatic glass lens.

### LINKABLE

The system can be powered from a single location using the P8740 direct-wire junction box (each fixture can also be direct-wired individually). Using the HAL3 linking cable accessories (P8733-P8743), the fixtures can

be linked together to form a continuous row of illumination. (Note: The linking cables can be used with or without the use of the P8740 junction box).

### DIMMING

Smooth and continuous dimming on many incandescent dimmer switches (Note: Reference manufacturers' minimum load requirements for dimmer switches). (Except P7002)

### TWO-LIGHT

**P7002-20** Bronze

**P7002-30** White

120V LED undercabinet. (Non-dimmable)

Size: 3-1/2" W., 9" L., Extends 1".

Lamps: 4w LED.



### EIGHT-LIGHT

**P7013-20** Bronze

**P7013-30** White

120V LED undercabinet.

Size: 3-1/2" W., 24" L., Extends 1".

Lamps: 14w LED.



### FOUR-LIGHT

**P7012-20** Bronze

**P7012-30** White

120V LED undercabinet.

Size: 3-1/2" W., 12" L., Extends 1".

Lamps: 8w LED.



### SIX-LIGHT

**P7005-20** Bronze

**P7005-30** White

120V LED undercabinet.

Size: 3-1/2" W., 18" L., Extends 1".

Lamps: 10w LED.



P7002-30

P7002-20

P7012-30

P7012-20

P7005-30

P7005-20

P7013-30

P7013-20

## Junction Box for HAL 3

### HAL3 JUNCTION BOX.

**P8740-20** Antique Bronze

**P8740-30** White.

Size: 3-1/4" W., 7/8" ht. 3-1/2" L.

### COUPLING CABLE

**P8743-20** Antique Bronze


**P8743-30** White

Connects two linking cables together.

Size: .75" W., .5" ht. 6" L.

P8740-30

P8743-20

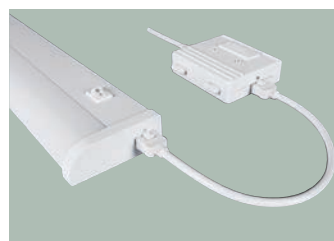

Shown P8740-30 with 8737-30



Side view showing cable connector

## T-5 Fluorescent Strips

### ELECTRICAL

Linkable and low-profile, with high brightness T-5 lamps. An on/off rocker switch is included.

### LAMPING

Each fixture includes a T-5 fluorescent lamp that has a 10,000hr average lamp life and 3000K color temperature. Non dimmable.

### CONSTRUCTION

Extruded aluminum housing with a white acrylic diffuser.

### MOUNTING AND INSTALLATION

Slotted holes allow easy mounting through housing. Tool-less electrical compartment entry.

### LINKABLE

These energy-efficient low profile fixtures have an integral on/off rocker switch, and a white acrylic diffuser. Available in 4 lengths, they can be linked together with the HAL3 Quick-link cables (P8733-P8743). The P8740 hardwire Junction box must be used to power the HAL3 T-5 fluorescent products.

#### P7020-30EBWB White

One, 8w T5 Linkable  
Size: 3-1/4" W., 1-1/8" ht. 12" L.  
Lamp: One F8T5 lamp included.



#### P7023-30EBWB White

Two, 13w T5 Linkable  
Size: 3-1/4" W., 1-1/8" ht. 42" L.  
Lamps: Two F13T5 lamps included.



#### P7021-30EBWB White

One, 13wt T5 Linkable  
Size: 3-1/4" W., 1-1/8" ht. 21" L.  
Lamp: One F13T5 lamp, 13w max. included.



#### P7022-30EBWB White

One, 8w and One, 13w T5 Linkable  
Size: 3-1/2" W., 1-1/8" ht. 34" L.  
Lamps: One F8T5 and one F13T5 included.



## Linking Cables for HAL 3

#### P8733-20 Antique Bronze

**P8733-30 White**  
12" Undercabinet fixture linking cable.  
Size: 3/4" W., 3/8" ht. 12" L.



P8733-30

#### P8735-20 Antique Bronze

**P8735-30 White**  
6" Undercabinet fixture linking cable.  
Size: 3/4" W., 3/8" ht. 6" L.



P8735-30

#### P8737-20 Antique Bronze

**P8737-30 White**  
18" Undercabinet fixture linking cable.  
Size: 3/4" W., 3/8" ht. 18" L.



P8737-30

#### P8738-20 Antique Bronze

**P8738-30 White**  
24" Undercabinet fixture linking cable.  
Size: 3/4" W., 3/8" ht. 24" L.



P8738-30



# HIDE a LITE 3

Undercabinet

PROGRESS **LED**

## 120V Xenon Strips

Direct Wire and Linkable, with long-life 120V Xenon lamps

### LAMPING

Each fixture includes 120V bi-pin 20W Xenon lamp(s) has an 8,000hr average lamp life.

### CONSTRUCTION

Formed steel housing with a frosted tempered glass lens.

### MOUNTING AND INSTALLATION

Multiple 7/8" knockouts at rear of fixture. Features Quick-Link connection ports at either end for easy linking connections to other HAL3 fixtures. Slotted holes allow mounting through housing. Tool-less electrical compartment entry.

### LINKABLE

The system can be powered from a single location using the P8740 direct-wire junction box (each

fixture can also be direct-wired individually).

Using the HAL3 Quick-Link cables (P8733-P8743), the fixtures can be linked together to form a continuous row of illumination. (Note: The linking connections can be used with or without the use of the P8740 junction box).

### STEP DIMMING

Each fixture features an integral high/low/off rocker switch. Can use standard incandescent dimmer.

### ONE-LIGHT

**P7032-20WB** Bronze

**P7032-30WB** White

120V Xenon undercabinet.

Size: 3-1/2" W., 9-1/2" L., Extends 1-1/4".

Lamp: One G8 bi-pin 120V Xenon lamp, 20w max (included).

### TWO-LIGHT

**P7033-20WB** Bronze

**P7033-30WB** White

120V Xenon undercabinet.

Size: 3-1/2" W., 12" L., Extends 1-1/4".

Lamps: Two G8 bi-pin 120V Xenon lamps, each 20w max (included).

### THREE-LIGHT

**P7034-20WB** Bronze

**P7034-30WB** White

120V Xenon undercabinet.

Size: 3-1/2" W., 18" L., Extends 1-1/4".

Lamps: Three G8 bi-pin 120V Xenon lamps, each 20w max (included).

### FOUR-LIGHT

**P7035-20WB** Bronze

**P7035-30WB** White

120V Xenon undercabinet.

Size: 3-1/2" W., 24" L., Extends 1-1/4".

Lamps: Four G8 bi-pin 120V Xenon lamps, each 20w max (included).



## Junction Box for HAL 3

### HAL3 JUNCTION BOX.

**P8740-20** Antique Bronze

**P8740-30** White

Size: 3-1/4" W., 7/8" ht. 3-1/2" L.

P8740-30



### COUPLING CABLE


**P8743-20** Antique Bronze

**P8743-30** White

Connects two linking cables together.

Size: .75" W., .5" ht. 6" L.

P8743-20

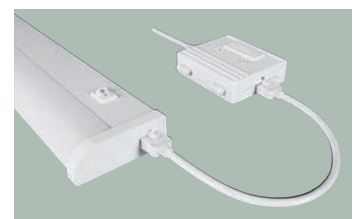

Shown P8740-30 with 8737-30



Side view showing cable connector

## CounterBrite®



THE HIDE-A-LITE COUNTERBRITE COMBINES A HALOGEN LAMP WITH A UNIQUE REFLECTOR DESIGN TO PROVIDE A WIDE DISTRIBUTION OF BRIGHT WHITE LIGHT.

When mounted 18" above work surface, one unit will light approximately three feet of counter. Multiple units can be used to provide lighting throughout the kitchen.

The Hide-a-Lite CounterBrite is 120v. No transformer is required.

Multiple units can be direct wired from one outlet box. The unit comes complete with a two-level hi-lo switch and 50w E-11 mini-can halogen lamp.

UL and CUL listed.

**P7533-30WB** White

**P7533-31WB** Black

One-light direct wire halogen undercabinet.  
Size: 4" W., 9-1/4" L.  
Extends 1-1/2".

Lamp: One 50w halogen lamp, E-11 mini-can base (included).

LAMPS



P7805-01 50w halogen lamp, E-11 mini-can base CounterBrite (P7533)



P7533-31WB



P7533-30WB

QUARTZ HALOGEN, LOW VOLTAGE DISC-LIGHTS PROVIDE HIGH INTENSITY WHITE LIGHT FOR UNDERCABINET AREAS WHERE DEMANDING TASKS ARE PERFORMED OR WHERE IT IS DIFFICULT TO PROVIDE SUPPLEMENTAL ROOM LIGHTING.



Surface mount.

Utilize a maximum 20w quartz halogen lamp (included).

For even illumination, space units the same distance apart as the mounting height over the work surface (18" mounting height = 18" spacing).

A single unit illuminates a circle approximately 1/3 larger than the mounting height (18" mounting height = 24" circle of light).

Not UL Listed.



P7520-30

**P7520-30 White**  
Surface mount – Under cabinets and shelves. White high temperature plastic with borosilicate clear lens. Designed for easy through wiring for #10 or #12 Romex, TFFN, or THHN wire. Easy re-lamping.  
Size: 2-7/8" dia., 1-1/8" ht.  
Lamp: One quartz halogen, (G4 Bi-pin) lamp, 20w max. Lamp included.



P7802-01 20w G-4 bi-pin replacement lamp for Hide-a-Lite 2 P7520-30.

12-VOLT TRANSFORMERS

These magnetic transformers (except 60w) have a special feature to provide either 12 volts or greater output to compensate for loading and to maximize lamp life.

All units are UL listed for dry locations.

All but the 60W unit can be mounted vertically or horizontally, and feature in-line secondary magnetic breakers to protect against short circuit.

The 600W Unit has two 300 watt circuits on the secondary and requires balanced loads on each for optimum operation.

Switches and dimmers (induction type only) must be installed on the primary (input) side only of the low voltage transformers.

Transformers can be loaded up to the maximum rating.

All units feature overload protection.



P8604-31



P8655-31



P8652-31

Product No.	Finish	Size		Capacity	Wattage
P8604-31	Black	3-1/2" W.	3-1/2" d.	5-1/4" ht.	60w
P8652-31	Black	3-1/2" W.	3-1/4" d.	8-1/2" ht.	100w
P8653-31	Black	4-1/8" W.	3-3/4" d.	8-1/2" ht.	150w
P8654-31	Black	4-1/8" W.	4-3/4" d.	8-1/2" ht.	300w
P8655-31	Black	4-5/8" W.	4-1/2" d.	12" ht.	600w (2-300w)

TRIM, ENERGY EFFICIENT FLUORESCENTS MOUNT EASILY UNDER CABINETS AND SHELVES, OVER A DESK, IN KITCHENS OR ANY WORK AREA. ALL HAVE A WHITE ACRYLIC DIFFUSER AND WHITE BAKED ENAMEL HOUSING. FOR UNITS WIRED TO A WALL SWITCH, SELECT MODELS WITHOUT A ROCKER SWITCH.

## Undercabinet Fluorescents



## T5 Electronic Slimline Direct Wire

Product No.	Finish	Description	Size	Ballast	Rocker Switch	G.C.O.	Lamp(s)
<b>P7004-30EBS</b>	White	12" T5	12-3/8" L., 3-5/8" W., 1-3/16" ht.	120V NPF Electronic	K.O.	K.O.	1-F8T5
<b>P7011-30EBS</b>	White	21" T5	21-3/8" L., 3-5/8" W., 1-3/16" ht.	120V NPF Electronic	K.O.	K.O.	1-F13T5
<b>P7014-30EBS</b>	White	24" T5	24-1/2" L., 3-5/8" W., 1-3/16" ht.	120V NPF Electronic	K.O.	K.O.	2-F8T5
<b>P7015-30EBS</b>	White	34" T5	34-1/2" L., 3-5/8" W., 1-3/16" ht.	120V NPF Electronic	K.O.	K.O.	1-F21T5
<b>P7016-30EBS</b>	White	43" T5	42-5/8" L., 3-5/8" W., 1-3/16" ht.	120V NPF Electronic	K.O.	K.O.	2-F13T5
<b>T5 Dual Voltage</b>							
<b>P7011-30DVEBS</b>	White	21" T5	21-3/8" L., 3-5/8" W., 1-1/2" ht.	120/277V HPF Electronic	K.O.	K.O.	1-F13T5



## T8 Electronic Slimline Direct Wire



Product No.	Finish	Description	Size	Ballast	Rocker Switch	G.C.O.	Lamp(s)
<b>P7017-30EBS</b>	White	18" T8 w/ Rocker Switch	18-3/8" L., 4" W., 1-5/8" ht.	120V NPF Electronic	Yes	K.O.	1-F15T8
<b>P7018-30EBS</b>	White	18" T8	18-1/4" L., 3-7/8" W., 1-5/8" ht.	120V NPF Electronic	K.O.	K.O.	1-F15T8
<b>P7007-30EBS</b>	White	24" T8	24-1/4" L., 3-7/8" W., 1-5/8" ht.	120V NPF Electronic	K.O.	K.O.	1-F17T8
<b>P7008-30EBS</b>	White	36" T8	36-1/8" L., 3-7/8" W., 1-5/8" ht.	120V NPF Electronic	K.O.	K.O.	1-F25T8
<b>P7009-30EBS</b>	White	48" T8	48-1/8" L., 3-7/8" W., 1-5/8" ht.	120V NPF Electronic	K.O.	K.O.	1-F32T8

### T8 Dual Voltage

<b>P7001-30EBS</b>	White	24" Dual Voltage	24-1/4" L., 3-7/8" W., 1-5/8" ht.	120/277V HPF Electronic	K.O.	K.O.	1-F17T8
<b>P7008-30DVEBS</b>	White	36" Dual Voltage	36-1/8" L., 3-7/8" W., 1-5/8" ht.	120/277V HPF Electronic	K.O.	K.O.	1-F25T8
<b>P7009-30DVEBS</b>	White	48" Dual Voltage	48-1/8" L., 3-7/8" W., 1-5/8" ht.	120/277V HPF Electronic	K.O.	K.O.	1-F32T8

## T8 Slimline Cord/Plug

Product No.	Finish	Description	Size	Ballast	Rocker Switch	G.C.O.	Lamp(s)
<b>P7019-30WB</b>	White	18" Cord & Plug w/ bulb	18-3/8" L., 4" W., 1-5/8" ht.	120V NPF	Yes	K.O.	1-F15T8 Included

## Undercabinet Accessories

Product No.	Finish	Description
<b>P8603-01</b>	White	Rocker Switch for use in models with Rocker Switch knockout.
<b>P8608-30</b>	White	Grounded Convenience Outlet for use in models with G.C.O. knockout.



# SCONC



# ES



SCONCES ARE VERSATILE FIXTURES THAT ADD STYLE AND FUNCTION TO A VARIETY OF ROOMS INCLUDING BATH AND VANITY AREAS, DINING ROOMS, HALLWAYS AND MEDIA ROOMS. SCONCES CONTRIBUTE TO A LAYERED LIGHTING DESIGN BY SUPPLEMENTING CHANDELIERS AND DOWNLIGHTING TO PROVIDE JUST THE RIGHT AMOUNT OF LIGHT IN A FAVORITE SPACE.

MANY SCONCES CAN BE CEILING OR WALL MOUNTED – WHILE OTHERS CAN BE INSTALLED HORIZONTALLY OR VERTICALLY FOR INCREASED VERSATILITY IN A HOME, OFFICE OR RESTAURANT.

## Beyond

THE BEYOND COLLECTION OFFERS A VARIETY OF DISTINCTIVE, MODERN DESIGNS WITH UPDATED CASUAL FLAIR. AVAILABLE IN ROUND OR SQUARE STYLES, THE ASSORTMENT FEATURES OPTIONS WITH TEXTURED GLASS, METAL OVERLAYS, OR GEOMETRIC ACRYLIC DIFFUSERS.



P2310-0930K9

**P2306-0930K9** Brushed Nickel  
Size: 12" W., 12" ht. Extends 2-5/8". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA

**P2307-0930K9** Brushed Nickel  
Size: 12" W., 12" ht. Extends 2-5/8". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA


**P2308-0930K9** Brushed Nickel  
Includes bronze, white and brushed nickel finials.  
Size: 12" W., 12" ht. Extends 12-7/8". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA



P2306-0930K9

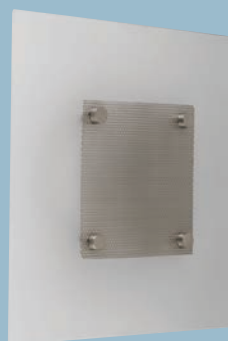

P2311-0930K9



P2307-0930K9



P2308-0930K9  
*Shown with bronze finial*



P2309-0930K9



P2308-0930K9



P2309-0930K9  
*Shown with bronze finial*



P2309-0930K9  
*Shown with white finial*

**P2309-0930K9** Brushed Nickel  
Includes bronze, white and brushed nickel finials.  
Size: 12" W., 12" ht. Extends 3". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA

**P2310-0930K9** Brushed Nickel  
Size: 10" W., 10" ht. Extends 2-1/2". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA

**P2311-0930K9** Brushed Nickel  
Size: 12" W., 12" ht. Extends 2-7/8". H/CTR 6".  
Lamp: One integral 17w LED module included.



ADA



P2308-0930K9  
*Shown with white finial*

## Arch

SCREEN-PRINTED LENS ACCESSORIES – IN FABRIC LINEN OR NATURE-INSPIRED PATTERNS – CAN BE INSERTED INTO THE FIXTURES FOR A UNIQUE EFFECT, WHILE A PERFORATED METAL MESH END CAP DIFFUSES LIGHT ABOVE AND BELOW THE FIXTURE TO PROVIDE EVEN ILLUMINATION.

**P2061-0930K9** Brushed Nickel  
Size: 7-1/4" W., 6" ht. Extends 3". H/CTR 3".  
Lamp: One integral 17w LED module included.



ADA

### OPTIONAL SHADE ACCESSORIES

**P8932-01** Fabric Linen Screen Print  
Size: 6-7/8" W., 6" ht. Extends 2-1/4".

**P8934-01** Scroll Screen Print  
Size: 6-7/8" W., 6" ht. Extends 2-1/4".



P2061-0930K9



P2061-0930K9 w/ P8932-01



P2061-0930K9 w/ P8934-01



## Balance

SOFT ACRYLIC LENS AND A BRUSHED NICKEL FINISH.  
INSTALLS VERTICALLY OR HORIZONTALLY.

**P2091-0930K9** Brushed Nickel  
Size: 6" W., 5" ht. Extends 3". H/CTR 2-1/2".  
Lamp: One integral 9w LED module included.



ADA

**P2092-0930K9** Brushed Nickel  
Size: 11-1/2" W., 5" ht. Extends 3". H/CTR 2-1/2".

Lamps: Two integral 9w LED modules included.



ADA



P2092-0930K9



P2091-0930K9

### LED FEATURES

- 120V AC Replaceable LED module
- 17w: 1211 lumens, 71.2 lumens per watt
- 9w: 623 lumens, 69.2 lumens per watt
- 3000K color temperature
- Dimmable to 10% with many ELV type dimmers
- 90+ CRI
- Energy Star and CA Title 24 Compliant

- 120V AC Replaceable LED module
- 1211 lumen source, 71.2 lumens per watt
- 3000K color temperature
- Dimmable to 10% with many ELV type dimmers
- 90+ CRI
- CA Title 24 and Energy Star Compliant
- Wall or Ceiling Mount

## Helm

WHITE ACRYLIC LENS.

**P3447-0930K9** Brushed Nickel  
**P3447-2030K9** Antique Bronze  
 Size: 11" sq., 3-3/4" ht.  
 Lamp: One 17w integral LED module included.



ADA

**P3448-0930K9** Brushed Nickel  
**P3448-2030K9** Antique Bronze  
 Size: 14" sq., 3-3/4" ht.  
 Lamps: Two 17w integral LED modules included.



ADA

**P3449-0930K9** Brushed Nickel  
**P3449-2030K9** Antique Bronze  
 Size: 18" sq., 3-3/4" ht.  
 Lamps: Three 17w integral LED modules included.



ADA



P3447-0930K9



P3448-2030K9



P3448-0930K9



P3449-0930K9



P3449-2030K9

## Transit

WHITE ACRYLIC LENS.



P3432-2030K9



P3417-2030K9



P3411-0930K9

**P3411-0930K9** Brushed Nickel  
**P3411-2030K9** Antique Bronze  
 Size: 11" sq., 3-3/4" ht.  
 Lamp: One 17w integral LED module included.



ADA

**P3417-0930K9** Brushed Nickel  
**P3417-2030K9** Antique Bronze  
 Size: 14" sq., 3-3/4" ht.  
 Lamps: Two 17w integral LED modules included.



ADA

**P3432-0930K9** Brushed Nickel  
**P3432-2030K9** Antique Bronze  
 Size: 18" sq., 3-3/4" ht.  
 Lamps: Three 17w integral LED modules included.



ADA



# LED Sconces

**P7083-0930K9** Brushed Nickel  
White Acrylic.  
Size: 8-7/8" W., 10-5/8" ht.  
Extends 4". H/CTR 5-3/8".  
Lamp: One integral 17w LED  
module included.



ADA

**P7085-0930K9** Brushed Nickel  
White Acrylic.  
Size: 9-1/2" W., 10-5/8" ht.  
Extends 3-3/4". H/CTR 10-3/8".  
Lamp: One integral 17w LED  
module included.



ADA

**P7088-0930K9** Brushed Nickel  
White Acrylic.  
Size: 8" W., 10-5/8" ht.  
Extends 3-7/8". H/CTR 5-3/8".  
Lamp: One integral 17w LED  
module included.



ADA

**P7092-0930K9** Brushed Nickel  
Etched Opal Enclosed  
One-piece Glass.  
Size: 8" W., 10-3/4" ht.  
Extends 4". H/CTR 5-1/2".  
Lamp: One integral 17w LED  
module included.



ADA

**P7093-3030K9** White  
White Glass. Includes bronze,  
white and brushed nickel finials.  
Size: 11-1/4" W., 11-5/16" ht.  
Extends 3-1/2". H/CTR 3".  
Lamp: One integral 17w LED  
module included.



ADA



P7085-0930K9



P7088-0930K9



P7093-3030K9  
Shown with white finial



P7093-3030K9  
Shown with brushed nickel finial



P7093-3030K9  
Shown with bronze finial



P7083-0930K9



P7092-0930K9

## Caress

CLEAR WATER GLASS WITH  
ETCHED GLASS DIFFUSER.

**P7046-104WB** Polished Nickel\*  
Size: 8" W., 15" ht. Extends  
9-1/2". H/CTR 8-7/8".  
Lamp: One E12 base krypton  
lamp, 60w max., included.



P7046-104WB

## Cliché

BENT GLASS PANELS FLOAT IN  
FRONT OF A CUSTOM ETCHED  
GLASS DIFFUSER.

**P2823-15WB** Polished Chrome  
Size: 7-1/2" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamp: One G9 base halogen  
lamp, 35w max., included.



P2823-15WB

## Reign

CLEAR, TEXTURED, LIGHT BENT  
GLASS PANELS FLOAT IN FRONT OF  
CUSTOM ETCHED GLASS DIFFUSER.

**P2842-20WB** Antique Bronze  
Size: 7-1/2" W., 5-1/2" ht.  
Extends 4-3/4". H/CTR 2-3/4".  
Lamp: One G9 base halogen  
lamp, 35w max., included.



P2842-20WB

Chandelier

pg 22



Close-to-ceiling

pg 302



## Engage

**P2033-09** Brushed Nickel\*  
**P2033-20** Antique Bronze\*  
Size: 7" W., 7" ht.  
Extends 5-1/4". H/CTR 3-1/2".  
Lamp: One krypton E12 lamp, 60w  
max. Use with.



P2033-09

## Streaming

**P2123-09** Brushed Nickel\*  
Size: 6" W., 5" ht.  
Extends 5". H/CTR 2-1/2".  
Lamp: One krypton candelabra  
lamp, 60w max.



P2123-09

\*P7807-01 lamp recommended

# Bingo


FASHION FORWARD CIRCULAR DESIGN  
WITH ETCHED OPAL GLASS SHADES AND  
IRONWORK PATTERN ON GLASS.

**P2026-09WB** Brushed Nickel  
**P2026-74WB** Venetian Bronze  
Two-light wall sconce with etched  
acrylic diffuser and distressed  
mirror glass accents.  
Size: 10-1/2" dia., 9" ht.  
Extends 3-7/8". H/CTR 4-1/2".  
Lamps: Two halogen G9 lamps,  
35w max., included.  
ADA



P2026-09WB

**P7056-09** Brushed Nickel  
**P7056-74** Venetian Bronze  
Size: 7-3/4" W., 10-1/4" ht.  
Extends 4". H/CTR 5-1/8".  
Lamp: One medium base  
lamp, 75w max.  
ADA

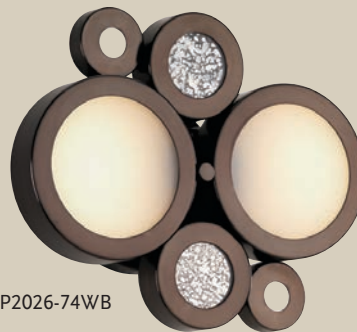

P2026-74WB



P7056-09



P7056-74

Close-to-ceiling

pg 317



Close-to-ceiling

pg 466



## Archive

ANTIQUE BRONZE WITH SATIN BRASS ACCENTS AND ANTIQUE NICKEL WITH BRUSHED NICKEL ACCENTS.

**P7156-20** Antique Bronze  
**P7156-81** Antique Nickel  
Size: 9" dia., 7" ht.  
Extends 10". H/CTR 2-3/8".  
Lamp: One medium base lamp, 100w max.



P7156-20



P7156-81

Pendant

pg 279



## Alabaster Glass

INCLUDES POLISHED BRASS, ANTIQUE BRONZE AND BRUSHED NICKEL BALL NUTS.

**P7079-09EBWB** Brushed Nickel  
Size: 12-1/4" W., 4-3/4" ht.  
Extends 6". H/CTR 2-3/8".  
Lamp: One GU24 CFL lamp 18w max., included.



**P7079-09EBWB**  
with Antique Bronze  
ball nuts



**P7079-09EBWB**  
with Brushed Nickel  
ball nuts

## Renovations

ETCHED RIBBED GLASS.

**P7122-77** Forged Bronze  
**P7122-81** Antique Nickel  
Etched ribbed glass  
Size: 15-5/8" W., 6-3/4" ht.  
Extends 7-3/4". H/CTR 2-3/4".  
Lamp: One medium base lamp, 100w max.

Chandelier

pg 146



Close-to-ceiling

pg 315



P7122-81



P7122-77

## Inspire

OFF-WHITE LINEN DRUM SHADE.

**P7026-30** White  
Size: 6" W., 9" ht., Extends 3-7/8". H/CTR 4-1/2".  
Lamp: One GU24 CFL lamp, 13w max.



Chandelier

pg 230



Close-to-ceiling

pg 325



P7026-30

## Savannah

ECRU ALABASTER GLASS,  
TOP COVER.

**P7210-42** Seabrook  
**P7210-86** Burnished Chestnut  
Size: 13" W., 7" ht.  
Extends 6-1/2". H/CTR 2-5/8".  
Lamp: One medium base lamp,  
100w max.



P7210-86

Chandelier  
pg 212



P7210-42

## Torino

BRUSHED NICKEL WITH ETCHED  
GLASS AND FORGED BRONZE WITH  
TEXTURED GLASS.

**P7181-09** Brushed Nickel with  
etched glass  
**P7181-77** Forged Bronze with tea  
stained glass  
Size: 9-1/2" W., 6-3/4" ht.  
Extends 4-3/4". H/CTR 2-7/8".  
Lamp: One medium base lamp,  
100w max.



P7181-09

Close-to-ceiling  
pg 314



Chandelier  
pg 128



P7181-77

## Spirit

**P7184-20** Antique Bronze  
**P7184-144** Pebbles  
Size: 9-1/2" W., 6-3/4" ht.  
Extends 4-3/4". H/CTR 2-7/8".  
Lamp: One medium base lamp,  
100w max.

Close-to-ceiling  
pg 323



Chandelier  
pg 208



P7184-20



P7184-144

## Etched Glass

**P7185-20** Antique Bronze  
Size: 9-1/2" W., 6-3/4" ht.  
Extends 4-3/4". H/CTR 2-7/8".  
Lamp: One medium base lamp,  
100w max.



P7185-20




# Anson

ONE-LIGHT CFL WALL SCONCE.  
ACRYLIC DIFFUSER.



P5736-09

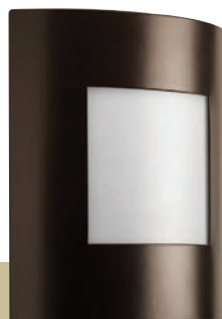

P5736-129

**P5736-09** Brushed Nickel  
**P5736-129** Architectural Bronze  
Size: 9-1/8" W., 10-1/4" ht.  
Extends 3-3/4". H/CTR 5-5/8".  
Lamp: One GU24 CFL lamp, 18w max.  
Wet location listed.  
ADA



# Arts & Crafts

LIGHT HONEY ART GLASS.

**P3002-46** Weathered Bronze

Size: 5" W., 14-1/2" ht.,  
Extends 4". H/CTR  
7-1/4".

Lamp: One medium base  
lamp, 100w max.  
ADA

**P7138-46EB** Weathered Bronze

Size: 5" W., 14-1/4" ht.,  
Extends 4". H/CTR 7-1/4".

Lamp: One GU24 CFL lamp,  
26w max.

ADA



P3002-46  
P7138-46EB



P3002-46  
P7138-46EB

Chandelier

pg 114



Close-to-ceiling

pg 311



# Jack

**P5948-20** Antique Bronze

Etched amber flax glass.

Size: 6" W., 13-5/8" ht.  
Extends 6-1/4". H/CTR 5-1/4".

Lamp: One medium  
base lamp, 100w max.

**P6045-31WB** Black

Etched glass.

Size: 6" W., 13-5/8" ht.  
Extends 6-1/4". H/CTR 5-1/4".

Lamp: One GU24 base CFL lamp,  
26w max, included.



P5948-20



P6045-31WB

## Etched Opal Glass

**P7052-09EB** Brushed Nickel  
**P7052-20EB** Antique Bronze  
 Satin opal glass.  
 Size: 7" W., 14" ht.  
 Extends 4". H/CTR 7".  
 Ballast: 120V NPF electronic  
 Lamp: One GU24 base CFL  
 lamp, 26w max.  
 ADA



**P7068-09** Brushed Nickel  
**P7068-20** Antique Bronze  
 Satin opal glass.  
 Size: 7" W., 14" ht.  
 Extends 4". H/CTR 7".  
 Lamp: One medium base lamp,  
 100w max.  
 ADA

**P7081-09** Brushed Nickel  
**P7081-20** Antique Bronze  
 Size: 4-1/2" W., 13-1/2" ht.  
 Extends 4". H/CTR 9-1/2".  
 Lamp: One GU24 base CFL  
 lamp, 26w max.  
 ADA



**P7082-09** Brushed Nickel  
**P7082-20** Antique Bronze  
 Size: 5" W., 18" ht. Extends 4".  
 H/CTR 15-3/8".  
 Lamp: One GU24 base CFL  
 lamp, 26w max.  
 ADA



P7081-20



P7082-20

P7068-20  
P7052-20EB

P7082-09

P7068-09  
P7052-09EB

P7081-09



Shown: P7082-09 sconce.

# Tri-Band Louver

PROVIDES ILLUMINATION FROM ABOVE,  
BELOW AND BETWEEN LOUVERS.

**P7103-30** White

**P7103-31** Black

Size: 14" W., 7" ht. Extends 7".

H/CTR 2-1/4".

Lamp: One medium base lamp,  
100w max.

P7103-31



P7103-30



# Eclipse

SATIN WHITE GLASS

**P7170-09** Brushed Nickel

Satin white glass.

Size: 15-1/4" W., 7-1/2" ht.

Extends 4". H/CTR 3".

Lamp: One medium base  
lamp, 100w max.

ADA

**P7175-20** Antique Bronze

Satin white glass.

Size: 15-1/4" W., 7-1/2" ht.

Extends 4". H/CTR 3".

Lamp: One medium base  
lamp, 100w max.

ADA

**P7171-09WB** Brushed Nickel

Satin white glass.

Size: 15-1/4" W., 7-1/2" ht.

Extends 4". H/CTR 3".

Ballast: 120V NPF electronic.  
Lamp: One 13w 4-pin Quad  
CFL included. G24q-1 base.

ADA



**P7176-20WB** Antique Bronze

Satin white glass.

Size: 15" W., 7-1/2" ht.

Extends 4". H/CTR 3".

Ballast: 120V NPF electronic.  
Lamp: One 26w 4-pin Quad  
CFL included. G24q-3 base.

ADA



P7170-09  
P7171-09WB



P7175-20  
P7176-20WB

Chandelier

pg 254



Close-to-ceiling

pg 340



# White Glass



P7045-09  
P7044-09EBWB



P7093-09EBWB

**P7044-09EBWB** Brushed Nickel

White glass.

Size: 14-3/4" W., 9-7/8" ht.

Extends 3-7/8". H/CTR 6."

Ballast: 120V NPF electronic

Lamps: Two 13w 4-pin Quad CFL  
included. G24q-1 base.

ADA



**P7045-09** Brushed Nickel

White glass.

Size: 14-3/4" W., 9-7/8" ht.

Extends 3-7/8". H/CTR 6."

Lamp: One medium base lamp,  
60w max.

ADA

**P7093-09EBWB** Brushed Nickel

Size: 11-1/4" W., 11-5/16" ht.

Extends 3-1/2". H/CTR 3".

Ballast: 120V NPF electronic

Lamps: Two 13w 4-pin Quad  
CFL included. G24q-1 base.

ADA



## Opal Glass

**P7153-09W** Brushed Nickel with white opal glass

**P7153-20W** Antique Bronze with white opal glass

Size: 15 3/8" W., 7" ht. Extends 7 1/2". H/CTR 2-1/2".

Lamp: One medium base lamp, 60w max.



P7153-09W



P7153-20W

## Etched Opal Glass

ENCLOSED ONE-PIECE GLASS.

**P7092-09WB** Brushed Nickel

Size: 8" W., 10-3/4" ht.

Extends 4". H/CTR 5-1/2".

Lamp: One GU24 CFL lamp, 26w max., included.



ADA



P7092-09WB

## Shelton

WHITE ACRYLIC

**P5790-09** Brushed Nickel

Mount vertically or horizontally.

Indoor or outdoor.

Size: 11" W., 5-5/8" ht. Extends 3-3/4".

Lamp: One 13w 4-pin CFL.

GX24q-3 base.

Wet location listed.



ADA



P5790-09

## Peek-a-Boo

ETCHED GLASS SHADE "PEEK THROUGH"  
ARCHED FRAME. CLEAN, CONTEMPORARY  
SCONCES IN SMALL AND LARGE VERSIONS.

**P6602-20** Antique Bronze

Size: 5-1/2" W., 13" ht.

Extends 3-1/4". H/CTR 7-1/4".

Lamp: One candelabra base lamp, 60w max.

**P6603-20** Antique Bronze

Size: 5-1/2" W., 17-1/8" ht.

Extends 3-1/4". H/CTR 10-3/4".

Lamp: One medium base T10 lamp, 60w max.



P6602-20



P6603-20

# Valera

WHITE ACRYLIC DIFFUSER.  
VERTICAL MOUNT ONLY.



P5800-09



P5800-20



P5801-09



P5801-20



P5806-09



P5806-20

**P5800-09** Brushed Nickel

**P5800-20** Antique Bronze

Size: 5-5/8" W., 8-1/8" ht.  
Extends 4".

Lamp: One GU24 CFL lamp,  
18w max.



**P5801-09** Brushed Nickel

**P5801-20** Antique Bronze

Size: 8-5/8" W., 11-1/8" ht.  
Extends 4".

Lamp: One GU24 CFL lamp,  
26w max.



**P5806-09** Brushed Nickel

**P5806-20** Antique Bronze

Size: 5-5/8" W., 16-1/8" ht.  
Extends 4".

Lamps: Two GU24 CFL lamps,  
each 18w max.



*Shown P5801-20 sconce.*



## Parker

VERSATILE WALL SCONCE CAN BE USED INDOORS AND OUTDOORS. TOP AND BOTTOM CAN BE REMOVED FOR INDOOR USE. VERTICAL MOUNT ONLY.


**P5914-16** Satin Aluminum  
**P5914-20** Antique Bronze  
 One-light CFL wall sconce.  
 White acrylic diffuser.  
 Size: 5-3/8" W., 10-1/4" ht.  
 Extends 4".  
 Lamp: One GU24 CFL lamp,  
 26w max.  
 ADA



**P5915-16** Satin Aluminum  
**P5915-20** Antique Bronze  
 Two-light CFL wall sconce.  
 White acrylic diffuser.  
 Size: 5-3/8" W., 16-7/8" ht.  
 Extends 4".  
 Lamps: Two GU24 CFL  
 lamps, each 26w max.  
 ADA




P5915-16

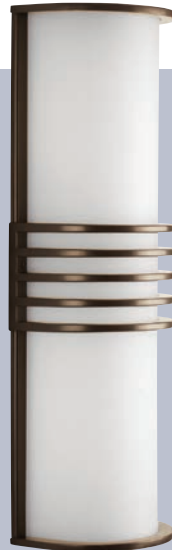


P5915-20



P5914-16

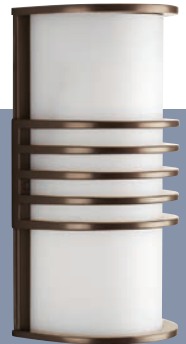

P5914-20

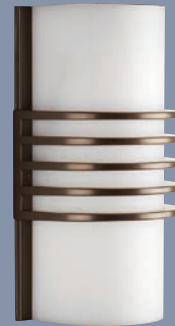

P5914-20  
 shown without top and  
 bottom for interior use.

## White Glass

**P7112-30** White  
 One-light with white glass  
 quartersphere.  
 Size: 11-1/2" W., 5" ht.  
 Extends 5-3/4". H/CTR 2-3/8".  
 Lamp: One medium base  
 lamp, 100w max.

**P7113-30** White  
 One-light with white glass  
 quartersphere.  
 Size: 11-1/2" W., 5-3/4" ht.  
 Extends 5". H/CTR 2-3/8".  
 Ballast: 120V NPF magnetic  
 Lamp: One 2-pin twin  
 CFL. GX23 base, 13w max.



P7112-30  
 P7113-30

## Etched Glass

**P7087-09** Brushed Nickel  
 Etched glass.  
 Size: 6-1/2" W., 11-1/8" ht.,  
 Extends 4". H/CTR 5-1/2".  
 Lamp: One medium base lamp,  
 100w max.  
 ADA



P7087-09

# Acrylic Wall Sconces

WHITE ACRYLIC. 120V NPF  
ELECTRONIC BALLAST.

**P7083-09EBWB** Brushed Nickel  
Acrylic alabaster swirl. Top cover.  
Size: 8-7/8" W., 10-5/8" ht.  
Extends 3-7/8". H/CTR 5-3/4".  
Lamp: One 18w 4-pin Quad CFL  
included. G24q-2 base.



ADA

**P7085-09EBWB** Brushed Nickel  
White acrylic. Top cover.  
Size: 9-3/8" W., 10-5/8" ht.  
Extends 3-7/8". H/CTR 5-1/2".  
Lamp: One 26w 4-pin Quad  
CFL included. G24q-3 base.



ADA

**P7249-09EBWB** Brushed Nickel  
**P7249-174EBWB** Urban Bronze  
White acrylic.  
Size: 10-3/8" dia. Extends 3-1/2".  
Lamp: One 22w 4-pin T-9  
circline included.



ADA



P7083-09EBWB



P7085-09EBWB



P7249-09EBWB



P7249-174EBWB

## White Glass

**P3111-30** White  
White glass. K.O. for G.C.O.  
Size: 4-1/4" W., 13" ht.  
Extends 4-1/2".  
Lamps: Two medium base  
lamps, each 75w max.

**P3813-30** White  
White glass. Rotary switch  
on socket.  
Size: 4-3/4" W., 7-1/2" ht.  
Extends 4".  
Lamp: One medium base  
lamp, 100w max.  
ADA



P3813-30



P3111-30

## Acrylic

**P3892-30** White  
White acrylic diffuser  
Size: 6" W., 8" ht.  
Extends 5-3/4". H/CTR 4".  
Lamp: One medium base  
lamp, 60w max.

**P3893-30** White  
Two-light with white acrylic diffuser  
Size: 6" W., 16" ht.  
Extends 5-3/4". H/CTR 8".  
Lamps: Two medium base  
lamps, each 60w max.



P3893-30



P3892-30

# The Wall Pockets™ System

PROGRESS LIGHTING WALL POCKETS™ ARE SHALLOW PROFILE DIFFUSERS THAT MOUNT ON A SURFACE MOUNT BACKPLATE.

## HOW TO ORDER

### STEP 1

Select a Surface Mount Backplate.

### STEP 2

Choose a diffuser option. Wall Pockets™ Diffusers must be used with Surface Mount Backplate.

## WALL POCKETS™ DIFFUSERS

**P7121-60** Opal White  
Acrylic wall pocket.  
Size: 14" W., 7" ht.  
Extends 4". H/CTR 3-1/4".  
ADA



P7121-60

**P7151-51** Faux Alabaster  
Quarter sphere wall sconce.  
Size: 17-1/4" W., 8-3/4" ht.  
Extends 4". H/CTR 2-7/8".  
ADA



P7151-51

**P7195-51** Faux Alabaster  
Bevel-cut diffuser.  
Size: 15-1/2" W., 7" ht.  
Extends 4". H/CTR 2-7/8".  
ADA




P7195-51

## SURFACE MOUNT BACKPLATE




Provides the light source for "Wall Pocket" diffusers. Can be mounted directly to an outlet box.

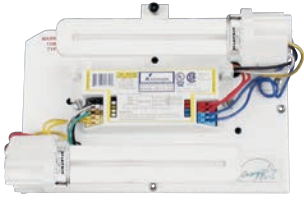

P7200-30  
P7200-30EB



P7200-30STRWB

Product No.	Description	Size	Ballast	Lamp(s)	
<b>P7200-30</b>	Surface mount backplate*	7-3/4" L., 4-3/4" W., Extends 2-1/2".	120V HPF magnetic	2 13w 2-pin twin CFL, GX23 base.	
<b>P7200-30EB</b>	Surface mount backplate*	7-3/4" L., 4-3/4" W., Extends 2-1/2".	120V/277V HPF electronic	2 13w 4-pin Quad CFL, G24q-1 base.	
<b>P7200-30STRWB</b>	ENERGY STAR surface mount backplate*	7-5/8" L., 4-3/4" W., Extends 2-1/2".	120V NPF electronic	2 13w 4-pin Quad CFL, G24q-1 base, included.	

\* Wall Pockets® Diffusers must be used with Surface Mount Backplate.

## Cylinder



P6398-30

### ONE LIGHT

**P6398-30** White

Adjustable wall or ceiling cylinder with black baffle.

Size: 5" dia., 8-1/2" ht.

Extends 9-3/4".

Lamp: One BR-30 medium base lamp, 75w max.



*Shown: P6398-30 cylinder.*

## On-Off Switch

### ONE-LIGHT

**P6155-09** Brushed Nickel

**P6155-30** White

Wall mount round back. On/off switch.

Size: 5" dia., 5" ht. Extends 6-7/8".

Lamp: One PAR 20 medium base lamp, 50w max.



P6155-30



P6155-09

Wisten

SIMPLE, MODERN AND ELEGANT, THE WISTEN FAMILY FEATURES A SCULPTURED LINEAR LOOK. ETCHED GLASS FOR SOFT CONTEMPORARY FEEL.



P3361-20



P3361-09



P3360-09



P3363-09



P3363-20



P3360-20

ONE-LIGHT

**P3360-09** Brushed Nickel  
**P3360-20** Antique Bronze  
Wall or ceiling mount.  
Size: 5-1/4" W., 8-1/2" ht.  
Lamp: One 18w GU24 CFL lamp.



THREE-LIGHT

**P3361-09** Brushed Nickel  
**P3361-20** Antique Bronze  
Wall or ceiling mount.  
Size: 11" W. canopy, 8-1/4" ht.  
Lamps: Three 18w GU24 CFL lamps.



FOUR-LIGHT

**P3362-09** Brushed Nickel  
**P3362-20** Antique Bronze  
Wall or ceiling mount.  
Size: 40" W., 9" ht.  
Lamps: Four 18w GU24 CFL lamps.



THREE-LIGHT

**P3363-09** Brushed Nickel  
**P3363-20** Antique Bronze  
Wall or ceiling mount.  
Size: 29-3/8" W., 9" ht.  
Lamps: Three 18w GU24 CFL lamps.



P3362-09



P3362-20



# Modern Directionals

## FOUR-LIGHT

**P6163-09WB** Brushed Nickel

**P6163-30WB** White

**P6163-174WB** Urban Bronze

Wall or ceiling mount.

Size: 35-1/2" W., 9" ht. Extends 7".

Lamps: Four MR-16 lamps, each 50w max. GU10 base (included).

## ONE-LIGHT

**P6154-09WB** Brushed Nickel

**P6154-30WB** White

**P6154-174WB** Urban Bronze

Wall-mount.

On/off switch.

Size: 5" dia., 6-1/8" ht.

Extends 4-7/8".

Lamp: One MR-16 lamp, 50w max. GU10 base (included).



P6154-09WB



P6154-174WB



P6154-30WB



P6163-09WB



P6163-174WB



P6163-30WB

# Round Back MR16

## ONE-LIGHT

**P6145-09WB** Brushed Nickel

**P6145-30WB** White

**P6145-174WB** Urban Bronze

Wall or ceiling mount round back.

Size: 5" dia., 5" ht. Extends 4-3/4".

Lamp: One MR-16 lamp, 50w max.

GU10 base (included).



P6145-30WB



P6145-174WB



P6145-09WB

# Pinhole Back

## ONE-LIGHT

**P6146-09WB** Brushed Nickel

**P6146-30WB** White

**P6146-174WB** Urban Bronze

Wall or ceiling mount pinhole back.

Size: 5" dia., 5" ht. Extends 5".

Lamp: One MR-16 lamp, 50w max.

GU10 base (included).



P6146-30WB



P6146-174WB

P6146-09WB

## THREE-LIGHT

**P6153-09WB** Brushed Nickel

**P6153-30WB** White

**P6153-174WB** Urban Bronze

Wall or ceiling mount pinhole back.

Size: 9-1/2" dia., 5" ht. Extends 4-1/4".

Lamps: Three MR-16 lamps, each

50w max. GU10 base (included).



P6153-30WB



P6153-174WB



P6153-09WB

# Round Back Directionals

MULTI-DIRECTIONAL HEADS ALLOWS  
AIMING OF LIGHT IN VARIOUS  
DIRECTIONS. BLACK BAFFLE.



P6160-174

## THREE-LIGHT

**P6160-09** Brushed Nickel

**P6160-30** White

**P6160-174** Urban Bronze

Wall or ceiling mount round back.

Size: 27" W., 6-5/8" ht. Extends  
6-5/8". H/CTR 2-3/8".

Lamps: Three PAR 20 lamps,  
each 50w max.



P6160-30



P6160-09

## FOUR-LIGHT

**P6162-09** Brushed Nickel

**P6162-174** Urban Bronze

Wall or ceiling mount round back.

Size: 36" W., 5-1/8" ht.

Lamps: Four Par 20 lamps, each  
50w max.



P6162-174



P6162-09

## FOUR-LIGHT

**P6161-09WB** Brushed Nickel

**P6161-30WB** White

**P6161-174WB** Urban Bronze

Wall or ceiling mount round back.

Size: 36" W., 5" ht.

Lamps: Four MR-16 lamps, each  
50w max. GU10 base (included).



P6161-174WB



P6161-09WB

# Round Back

## ONE-LIGHT

**P6147-09** Brushed Nickel

**P6147-30** White

**P6147-174** Urban Bronze

Ceiling mount round back.

Size: 5" dia., 5" ht. Extends 6-1/2".

Lamp: One PAR 20 medium base lamp, 50w max.



P6147-30



P6147-174



P6147-09

## TWO-LIGHT

**P6149-09** Brushed Nickel

**P6149-30** White

**P6149-174** Urban Bronze

Wall or ceiling mount round back.

Size: 8-1/8" dia., 12-1/8" ht.

Extends 6-1/2".

Lamps: Two PAR 20 medium base lamps, each 50w max.



P6149-30



P6149-09



P6149-174

## ONE-LIGHT

**P6144-30** White

**P6144-174** Urban Bronze

Wall or ceiling mount round back.

Size: 5" dia., 5-1/2" ht.

Extends 6-5/8".

Lamp: One PAR 30 medium base lamp, 75w max.



P6144-30



P6144-174

# Heat Lamp



P6397-30

## ONE LIGHT

**P6397-30** White

Adjustable wall or ceiling heat lamp with black baffle.

Size: 5-3/4" dia., 8-1/8" ht.

Extends 11".

Lamp: One BR-40 medium base lamp, 250w max.

## LED Track - 6w<sup>1</sup>

6W LED, 400 LUMENS, 90+ CRI

**P9061-0930K9** Brushed Nickel  
**P9061-2830K9** White  
**P9061-3130K9** Black  
 Size: 3-1/4" dia., 6-3/8" ht.  
 Lamp: One 6w integral LED included.

**P9071-0930K9** Brushed Nickel  
**P9071-2830K9** White  
**P9071-3130K9** Black  
 Size: 3" dia., 7" ht.  
 Lamp: One 6w integral LED included.

**P9081-2830K9** White  
**P9081-3130K9** Black  
 Size: 2-7/8" dia., 7-1/8" ht.  
 Lamp: One 6w integral LED included.



P9061-3130K9



P9061-0930K9



P9061-2830K9



P9071-0930K9



P9071-2830K9



P9081-3130K9



P9081-2830K9

## LED Track - 9w<sup>1</sup>

9W LED, 600 LUMENS, 90+ CRI

**P9062-0930K9** Brushed Nickel  
**P9062-2830K9** White  
**P9062-3130K9** Black  
 Size: 3-5/8" dia., 7-3/4" ht.  
 Lamp: One 9.3w integral LED included.

**P9072-0930K9** Brushed Nickel  
**P9072-2830K9** White  
**P9072-3130K9** Black  
 Size: 2.5" dia., 7-5/8" ht.  
 Lamp: One 9.3w integral LED included.

**P9082-2830K9** White  
**P9082-3130K9** Black  
 Size: 3-3/8" dia., 7-1/2" ht.  
 Lamp: One 9.3w integral LED included.



P9082-2830K9



P9062-0930K9



P9062-3130K9



P9072-3130K9



P9072-0930K9



P9072-2830K9



## LED Flex-Track<sup>2</sup>

120V LINE VOLTAGE, 6W LED,  
400 LUMENS, 90+ CRI

**P9021-0930K9** Brushed Nickel  
**P9021-2030K9** Antique Bronze  
Size: 2-7/8" dia., 6-1/2" ht.  
Lamp: One 6w integral LED module included.

**P9031-0930K9** Brushed Nickel  
**P9031-2030K9** Antique Bronze  
Size: 2-1/2" dia., 7" ht.  
Lamp: One 6w integral LED module included.



P9021-0930K9



P9021-2030K9




P9031-0930K9




P9031-2030K9

## LED Track Accessories

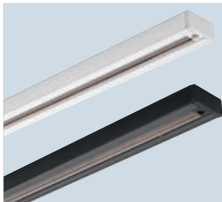

**P9054-09** Brushed Nickel  
**P9054-20** Antique Bronze  
4' of 120V Straight Track.  
Size: 1-1/2" W, 1/2" ht., 4' L.

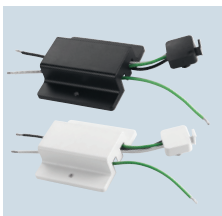

**P9051-28** White  
**P9051-31** Black  
Floating Power Canopy  
Size: 4-1/4" W, 1-1/3" ht.



**P9052-01**  
Straight Connector. White with black cap. Can be used with both white and black track.  
Size: 3/4" W, 1-1/3" ht.

## LED Flex-Track Accessories



**P9010-09** Brushed Nickel  
**P9010-20** Antique Bronze  
6' of 120V Line Voltage Flexible Track with 4 support stems, end caps, and mounting hardware. Track can be field-cut to desired length.  
Size (track): 7/8" H, 6' L.  
Size (sppt. stems): 7/8" W, 4-3/4" H.



**P9001-09** Brushed Nickel  
**P9001-20** Antique Bronze  
Straight Connector Adapter  
Size: 1-1/8" W, 7/8" ht.

<sup>1</sup> Note: LED Track is not compatible with AlphaTrack. Must use LED track accessories with LED track heads.

<sup>2</sup> Note: LED Flex-Track is not compatible with IllumaFlex. Must use Flex-Track accessories with Flex-Track track heads.



Note:  
Height is to bottom of track.

ILLUMA-FLEX™

## Low voltage Mini-pendants

USED WITH ILLUMA-FLEX™ FLEXIBLE TRACK LIGHTING SYSTEM  
OR WITH ALPHA TRAK® STANDARD TRACK PRODUCTS.\*

**P6138-09** Brushed Nickel  
Mini-pendant with metal shade.  
Size: 2-5/8" dia., 9" ht. Overall ht.  
w/cord 72".  
Lamp: One T-4 lamp, 35w max.,  
GY6.35 halogen bi-pin base, included.

**P6140-09Y** Brushed Nickel  
Mini-pendant with Yellow  
Mottled Glass  
Size: 3-5/8" dia., 6-1/2" ht.  
Overall ht. w/cord 72".  
Lamp: One T-4 lamp, 35w  
max., GY6.35 halogen bi-pin  
base, included.

**P6178-09BW** Brushed Nickel  
Mini-pendant with  
White Glass and black  
Pencil Wrap  
Size: 3-1/2" dia., 9" ht. Overall ht.  
w/cord 72".  
Lamp: One T-4 lamp, 50w max.,  
GY6.35 halogen bi-pin base,  
included.

**P6182-09CL** Brushed Nickel  
Mini-pendant with Clear Glass.  
Size: 6-3/8" dia., 5-1/4" ht.  
Overall ht. w/cord 72".  
Lamp: One T-4 lamp, 50w  
max., GY6.35 halogen bi-pin  
base, included.

\* Includes a converting adapter for  
monopoint mounting (P8780) or with  
a P8516 transformer to mount to  
standard Alpha Trak®.

Order with track, transformer or  
monopoint. See pages 512-513.

P6182-09CL



P6178-09BW



P6138-09



P6140-09Y





*Illuma-Flex® system with P6139-09W mini-pendants.*

**P6139-09A** Brushed Nickel  
Mini-pendant with clear Amber Glass

**P6139-09R** Brushed Nickel  
Mini-pendant with clear Red Glass

**P6139-09W** Brushed Nickel  
Mini-pendant with clear White Glass  
Size: 5" sq., 4-1/4" ht. Overall ht.  
w/cord 72".

Lamp: One T-4 lamp, 50w max.,  
GY6.35 halogen bi-pin base, included.



ILLUMA-FLEX™

## Low Voltage Mini-Pendants

USED WITH ILLUMA-FLEX™ FLEXIBLE TRACK LIGHTING SYSTEM  
OR WITH ALPHA TRAK® STANDARD TRACK PRODUCTS.\*

**P6135-09W** Brushed Nickel  
Mini-pendant with White Glass  
surrounded by clear glass.  
Size: 4-1/2" dia., 5" ht. Overall ht.  
w/cord 72".  
Lamp: One T-4 lamp, 50w max.,  
GY6.35 halogen bi-pin base, included.

**P6136-09A** Brushed Nickel  
Mini-pendant with Amber Glass  
**P6136-09W** Brushed Nickel  
Mini-pendant with White Glass  
Size: 2-3/8" dia., 5-3/4" ht.  
Overall ht. w/cord 72".  
Lamp: One T-4 lamp, 35w max.,  
GY6.35 halogen bi-pin base,  
included.

**P6137-09W** Brushed Nickel  
Mini-pendant with White Glass  
Size: 6-3/4" dia., 5-1/4" ht.  
Overall ht. w/cord 72".  
Lamp: One T-4 lamp, 50w max.,  
GY6.35 halogen bi-pin base, included.

P6137-09W

P6136-09W

P6136-09A

P6135-09W

\*Includes a converting adapter for monopoint  
mounting (P8780) or with a P8516 transformer  
to mount to standard Alpha Trak®.

Order with track, transformer or monopoint. See page 521-523.

ILLUMA-FLEX™

## Adjustable MR-11 Track Heads

MR-11 LOW VOLTAGE LAMPS, 35W MAX.

ADJUSTABLE TO 358° HORIZONTALLY AND 90° VERTICALLY

**P6119-09** Brushed Nickel  
Flex track head with mesh shade.  
Size: 3-1/8" dia., 6" ht.  
Lamp: One MR-11 lamp, 35w max.,  
GU4 bi-pin base, included.



## Adjustable MR-16 Track Heads

MR-16 LOW VOLTAGE LAMPS, 50W MAX.

ADJUSTABLE TO 358° HORIZONTALLY AND 90° VERTICALLY

**P6124-09W** Brushed Nickel  
Flex track head with White Glass  
Size: 2-3/8" dia., 6" ht.  
Lamp: One MR-16 lamp, 50w max.,  
GU5.3 bi-pin base (included).

**P6125-09** Brushed Nickel  
Flex track head with fixed gimbal.  
Size: 2-3/4" dia., 7-1/4" ht.  
Lamp: One MR-16 lamp, 50w max.,  
GU5.3 bi-pin base, included.

**P6126-09** Brushed Nickel  
Flex track head with bare lamp  
Size: 3-1/2" dia., 6-1/16" ht.  
Lamp: One MR-16 lamp, 50w max.,  
GU5.3 bi-pin base, included.




*Illuma-Flex® system with P6119-09 track heads.*




ILLUMA-FLEX™


## Track and Support Stems

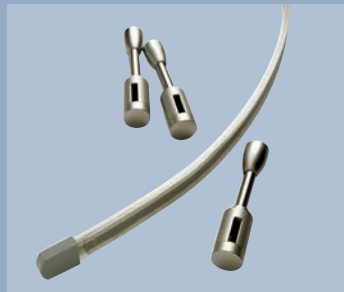

**P6227-09** Brushed Nickel  
6' of Flexible Track with 3 support stems, end caps, and mounting hardware. Track can be field-cut to desired length.  
Size (track): 7/8" H, 6' L.  
Size (sppt. stems): 7/8" W, 4-3/4" H.

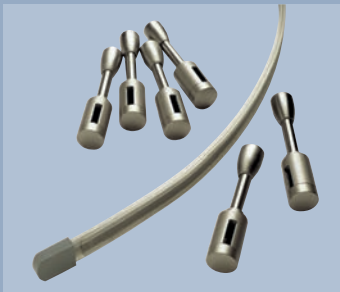

**P6228-09** Brushed Nickel  
12' of Flexible Track with 6 support stems, end caps, and mounting hardware. Track can be field-cut to desired length.  
Size (track): 7/8" H, 12' L.  
Size (sppt. stems): 7/8" W, 4-3/4" H.

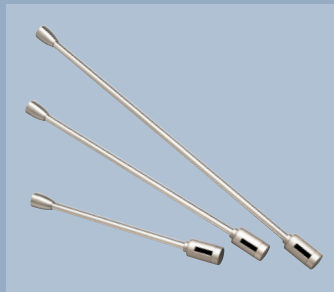

**P8782-09** Brushed Nickel  
4" remote support stems (6-pack).  
Size: 7/8" W, 4" H.

**P8783-09** Brushed Nickel  
8" remote support stems (6-pack).  
Size: 7/8" W, 8" H.

**P8784-09** Brushed Nickel  
12" remote support stems (6-pack).  
Size: 7/8" W, 12" H.


**P8785-09** Brushed Nickel  
16" remote support stems (6-pack).  
Size: 7/8" W, 16" H.

\* **Note:** All stems 8" or longer require remote power feeds to drop power to the track. These stems cannot be used with surface transformers.

## Accessories



**P8780-09** Brushed Nickel  
Quick-connect monopoint. Includes integral 50w electronic low voltage transformer. Monopoint mounts to an electrical ceiling box. Illuma-Flex fixtures using the P8777 converting adapter (included with all Illuma-Flex fixtures) easily connect to the monopoint with a quick push and turn connection, no fixture to box wiring required.  
Size: 5-7/8" dia., 3-3/8" ht.

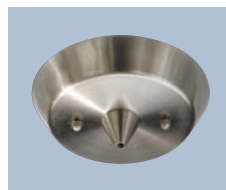

**P8794-09** Brushed Nickel  
Designer monopoint. Includes integral 75w electronic low voltage transformer. Monopoint mounts to an electrical ceiling box.  
Size: 5-3/8" dia., 2" ht.



**P8776-09** Brushed Nickel  
250w. Flex Track transformer  
Size: 9-3/4" dia., 4-3/4" ht.



**P8777-09** Brushed Nickel  
Converting adapter for mounting flexible track products to Alpha Trak® system. Included with all Illuma-Flex fixtures. Must be used with P8516 transformer  
Size: 7/8" dia., 2-1/8" L.



**P8781-09** Brushed Nickel  
Illuma-Flex T-bar Adapter  
Allows support to be mounted to a t-bar ceiling. Set of six adapters included. Support stems not included.  
Size: 1-1/2" W., 1-3/8" ht.



**P8778-09** Brushed Nickel  
Illuma-Flex Power link. Electrically links two sections of track together. Designed to be used with or without support stem.  
Size: 3-3/8" W., 1-5/8" ht.



**P8795-09** Brushed Nickel  
Illuma-Flex track link (non-powered). Mechanically joins two sections of track together. Designed to be used with or without support stem.  
Size: 3-3/8" W., 1-5/8" ht.

## Remote Mount Accessories



P8652-31

### Transformers

Product No.	Finish	Size	Capacity	Wattage
<b>P8652-31</b>	Black	3-1/2" W. 3-1/4" d.	8-1/2" ht.	100w
<b>P8653-31</b>	Black	4-1/8" W. 3-3/4" d.	8-1/2" ht.	150w
<b>P8654-31</b>	Black	4-1/8" W. 4-3/4" d.	8-1/2" ht.	300w
<b>P8655-31</b>	Black	4-5/8" W. 4-1/2" d.	12" ht.	600w (2-300w)

Transformers can be mounted horizontally or vertically



**P8786-09** Brushed Nickel  
Remote transformer power feed canopy. Must be used with power feed stems (P8790-P8793).  
Size: 5-1/2" dia., 1-3/4" ht.



**P8790-09** Brushed Nickel  
4" remote transformer power feed stems.  
Size: 1" dia., 3-5/8" ht.

**P8791-09** Brushed Nickel  
8" remote transformer power feed stems.  
Size: 1" dia., 7-1/8" ht.


**P8792-09** Brushed Nickel  
12" remote transformer power feed stems.  
Size: 1" dia., 11-1/8" ht.

**P8793-09** Brushed Nickel  
16" remote transformer power feed stems.  
Size: 1" dia., 15-1/8" ht.

## Wall Mount Accessories



**P8707-09** Brushed Nickel  
Wall mount remote power feed. Includes stem, cable and canopy. Adjustable from 8" - 12" from wall.  
Size: 1" dia., 3" ht.

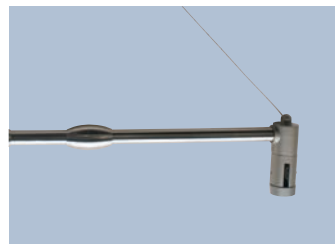

**P8706-09** Brushed Nickel  
Wall mount support stems (6-pack). Stems adjustable from 8" - 12" from wall.  
Size: 1" dia., 3" ht.

# ALPHA TRAK®

## Line Voltage Adjustable Track Heads

THESE FIXTURES INCLUDE A GU-10 TWIST-AND-LOCK MR-16 LAMP THAT PROVIDES THE SAME VISUAL APPEAL AS A TRADITIONAL LOW VOLTAGE MR-16 LAMP WITHOUT THE NEED FOR A TRANSFORMER.

Economical AlphaTrak® accommodates PAR halogen or standard BR lamps. Most lampholders are complete with black step baffle for improved glare control. Lampholder rotates 358° horizontally and 90° vertically. Track mounting hardware and fixture accessories appear on pages 521-523.

**P6111-09W** Brushed Nickel with White Glass\*  
Size: 2-3/8" dia., 3-3/4" ht.  
Lamp: One MR-16 lamp, 50w max., included.  
GU10 twist lock base.

*\*Coated lamp to eliminate pink hue through the white glass.*

**P6112-09** Brushed Nickel  
Size: 2-9/16" dia., 5-7/8" ht.  
Lamp: One MR-16 lamp, 50w max., included. GU10 twist lock base.

Versatile track fixtures are fully adjustable (358° horizontally, 90° vertically) and can be aimed to perform a wide array of general and accent lighting tasks.



**P6115-09WB** Brushed Nickel  
Die-cast gimbal track head  
Size: 2-7/8" dia., 5-1/4" ht.  
Lamp: One 120V MR-16 lamp, 50w max., included. GU10 twist lock base.

**P6116-09** Brushed Nickel  
Die-cast gimbal track head  
Size: 3-5/8" dia., 6-7/8" ht.  
Lamp: One PAR 20, 50w max.

**P6117-09** Brushed Nickel  
Die-cast gimbal track head  
Size: 4-5/8" dia., 8" ht.  
Lamp: One PAR 30, 75w max.



Note:  
Height is  
to bottom  
of track.

# Flatback

**P9205-28** Bright White  
**P9205-31** Black  
 Complete with black baffle.  
 Size: 3-1/2" dia., 7-1/4" ht.  
 Lamp: One 50w PAR 20, one  
 50w R 20, or one 75w PAR 16.

**P9206-28** Bright White  
**P9206-31** Black  
 Complete with black baffle.  
 Size: 4-3/8" dia., 9" ht.  
 Lamp: One 75w PAR 30 long  
 neck or one 65w BR 30.

**P9207-28** Bright White  
**P9207-31** Black  
 Complete with black baffle.  
 Size: 6" dia., 10-7/8" ht.  
 Lamp: One 250w PAR 38, one  
 300w R 40, or one 250w BR 40.



P9205-31



P9205-28



P9206-31



P9206-28



P9207-31



P9207-28

See pages 521-523 for accessories.

# ALPHA TRAK<sup>®</sup>

Line Voltage Adjustable Track Heads

## Flair

**P9200-28** Bright White

**P9200-31** Black

Complete with black baffle.

Size: 3-1/2" dia., 7-5/8" ht.

Lamp: One 50w PAR 20, one  
50w R 20, or one 75w PAR 16.

**P9201-28** Bright White

**P9201-31** Black

Complete with black baffle.

Size: 4-3/8" dia., 8-3/4" ht.

Lamp: One 75w PAR 30  
long neck or one 65w BR 30.



## Universal

SIMPLE DESIGN PROVIDES MINIMAL  
OBTRUSION INTO THE VISUAL  
SPACE. LAMPHOLDER ROTATES 360°  
HORIZONTAL, 90° VERTICAL.

**P6280-28** Bright White

**P6280-31** Black

Size: 2" dia., 4-7/8" ht.

Lamp: Any medium base PAR  
or R lamp except PAR 30 short  
neck up to 300w max.



Note:  
Height is  
to bottom  
of track.

See pages 521-523 for accessories and track.



## High Tech

EXCELLENT FOR RESIDENTIAL AND  
RETAIL APPLICATIONS. LAMPHOLDER  
ROTATES 360° HORIZONTAL, 90° UP  
FROM VERTICAL.

**P6325-28** Bright White  
**P6325-31** Black  
Size: 2-3/4" dia., 5-1/2" ht.  
Lamp: One 75w PAR 16.

**P6326-28** Bright White  
**P6326-31** Black  
Size: 2-3/4" dia., 5-1/2" ht.  
Lamp: One 50w PAR 20.

**P6327-28** Bright White  
**P6327-31** Black  
Size: 4" dia., 6" ht.  
Lamp: One 75w PAR 30  
short neck

**P6369-28** Bright White  
Size: 5" dia., 7" ht.  
Lamp: One 250w PAR 38.



P6326-31



P6325-28



P6325-31



P6326-28



P6327-31



P6369-28

## Roundback

**P9203-28** Bright White  
**P9203-31** Black  
Complete with black baffle.  
Size: 3-1/2" dia., 7-1/4" ht.  
Lamp: One 50w PAR 20, one  
50w R 20, or one 75w PAR 16.

**P9204-28** Bright White  
**P9204-31** Black  
Complete with black baffle.  
Size: 4-3/8" dia., 8" ht.  
Lamp: One 75w PAR 30 long  
neck or one 65w BR 30.



P9203-31



P9204-28

# ALPHA TRAK<sup>®</sup>

## Line Voltage Adjustable Track Heads

### Shallow Profile

NON-METALLIC, ARCHITECTURALLY-DESIGNED MOLDED FITTER. DESIGNED FOR PAR 20 AND PAR 30 LAMPS. LAMPHOLDER ROTATES 360° HORIZONTALLY, 90° VERTICALLY.

**P9219-28** Bright White  
**P9219-31** Black  
 Size: 3-1/2" dia., 5-3/4" ht.  
 Lamps: One 50w PAR 20

**P9220-28** Bright White  
**P9220-31** Black  
 Size: 4-3/4" dia., 6" ht.  
 Lamps: One 75w PAR 30.



P9220-31



P9219-31



P9220-28



P9219-28

### Free Form

CLEAN DESIGN TO ACCOMMODATE THE EXPOSED PORTION OF THE PAR LAMPS. FOR RETAIL AND ACCENT LOCATIONS. LAMPHOLDER ROTATES 360° HORIZONTAL, 90° VERTICAL.

**P6328-28** Bright White  
 Size: 3-1/4" dia., 4-1/8" ht.  
 Lamp: One 50w PAR 20 or 75w PAR 16.

**P6329-28** Bright White  
 Size: 4-5/8" dia., 4-3/4" ht.  
 Lamp: One 75w PAR 30 short neck.



P6328-28




P6329-28



Note:  
Height is  
to bottom  
of track.

## Low Voltage

### Miniature Halogen

UTILIZING INTEGRAL TRANSFORMERS WITH MR-16 LOW VOLTAGE  LAMPS, THESE FULLY-ADJUSTABLE (358° HORIZONTALLY, 90° VERTICALLY) TRACK HEADS PROVIDE DRAMATIC LIGHT TO ANY ROOM AREA.

Heads can be easily repositioned on the track to provide lighting in different areas of the room.



P6339-28



P9218-31

**P6104-09** Brushed Nickel  
Size: 2-3/4" dia., 8-1/4" ht.  
Lamp: One MR-16 lamp, 50w max., included. GU5.3 bi-pin base.



P6339-09

**P6105-09** Brushed Nickel  
Size: 2-5/8" dia., 6-7/8" ht.  
Lamp: One MR-16 lamp, 50w max., included. GU5.3 bi-pin base.



P6105-09

**P6339-09** Brushed Nickel

**P6339-28** Bright White

**P6339-31** Black

Size: 2-1/8" dia., 4-7/8" ht.

Lamp: One MR-16 lamp, 50w max.

GU5.3 bi-pin base.



P6104-09

**P9218-31** Black

Size: 2-1/8" W., 4-1/8" ht.

Lamp: One MR-16 lamp, 50w max.

GU5.3 bi-pin base.



See pages 521-523 for accessories and track.

# ALPHA TRAK®

Line Voltage Adjustable Track Heads

## Alpha Trak® Kits

ALL ALPHA TRAK® KITS COME WITH THREE TRACK HEADS, 4' TRACK, CANOPY, DEAD END, FEED AND MOUNTING HARDWARE.

**P9215-28** Bright White  
Track heads complete with black baffle.  
Size: 4-3/8" dia., 8-1/2" ht.  
Lamps: Three 75w PAR 30 long neck or three 65w BR 30.



P9215-28  
Flair

**P9216-28** Bright White  
Track heads complete with black baffle.  
Size: 4-3/8" dia., 8-3/4" ht.  
Lamps: Three 75w PAR 30 or three 65w BR 30.



P9216-28  
Flat Back

**P9217-28** Bright White  
Complete with three 12V electronic transformers.  
Size: 2-1/8" dia., 5-1/4" ht.  
Lamps: Three 50w MR16.



P9217-28  
High Tech

# Track Accessories

## Alpha Trak® Connectors

For joining two or more track sections in straight runs, "L", "T", cross, square and "any angle" patterns. The connectors plug into track sections only one way to ensure positive polarization.

 
## Alpha Trak® Sections



Bright White



Black



Brushed Nickel

Alpha Trak single-circuit track sections are extruded aluminum with flat copper conductors for positive contact and can be field cut to required lengths. All have easy-guide polarity notch. Designed for 120-volt supply with 20 amp capacity (2,400 watts). Order power feeds and system hardware separately as required.



### STRAIGHT CONNECTOR

**P8720-09** Brushed Nickel

**P8720-31** Black

**P9115-28** Bright White



### "L" CONNECTOR

A. Inside polarity

**P8721-9109** Brushed Nickel

**P8721-9131** Black

**P9116-9128** Bright White



B. Outside polarity

**P8721-8909** Brushed Nickel

**P8721-8931** Black

**P9116-8928** Bright White

"L" connector. Inside polarity type connector generally used. To identify polarity, orient connector to "L" shape and polarity grooves will intersect where indicated.



Cross section of track

All track sections include two dead ends and mounting hardware.

Product No.	Finish	Size
<b>P9103-09</b>	Brushed Nickel	2' L.,
<b>P9103-28</b>	Bright White	1-1/8" W.,
<b>P9103-31</b>	Black	7/8" ht.
<b>P9104-09</b>	Brushed Nickel	4' L.,
<b>P9104-28</b>	Bright White	1-1/8" W.,
<b>P9104-31</b>	Black	7/8" ht.
<b>P9105-09</b>	Brushed Nickel	8' L.,
<b>P9105-28</b>	Bright White	1-1/8" W.,
<b>P9105-31</b>	Black	7/8" ht.
<b>P9106-09</b>	Brushed Nickel	12' L.,
<b>P9106-28</b>	Bright White	1-1/8" W.,
<b>P9106-31</b>	Black	7/8" ht.

## Typical Layout Plan Combinations



### CROSS CONNECTOR

**P8723-09** Brushed Nickel

**P8723-28** Bright White

**P8723-31** Black




### "T" CONNECTOR

A. Inside-right polarity

**P8722-9109** Brushed Nickel

**P8722-9128** Bright White

**P8722-9131** Black

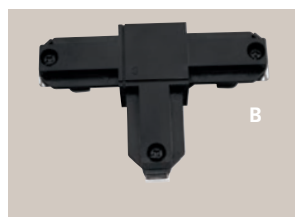

B. Inside-left polarity

**P8722-8909** Brushed Nickel

**P8722-8928** Bright White

**P8722-8931** Black

"T" connector. Inside-right polarity type connector generally used. To identify polarity, orient connector to "T" shape and polarity grooves will intersect where indicated.



### FLEX CONNECTOR


**P8736-09** Brushed Nickel,

**P8736-31** Black


**P9117-28** Bright White

Flex connector permits a variety of track layouts at almost any angle and variation of planes including wall-to-ceiling or on cathedral ceilings. Can flex to 90°.


### Straight Runs

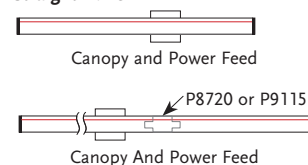


### Flex Connector

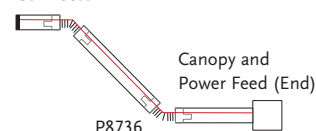


### Cross Layout

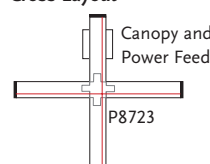


### "L" Layout

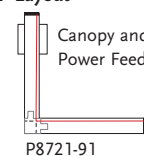


### "T" Layout

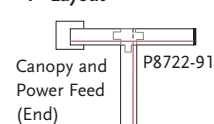


### Grid Layout

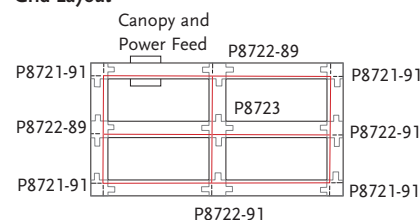


### "H" Layout

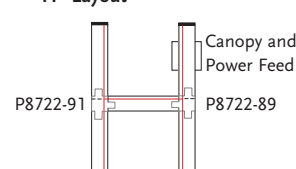

### Modified Grid Layout

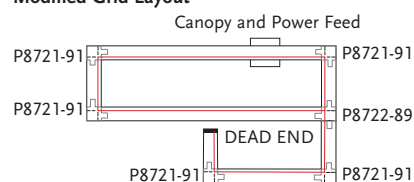

### Dog Leg Layout

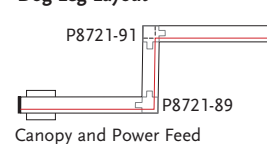



# Track Accessories

## Alpha Trak® Power Feeds



Dead End

**P8717-09** Brushed Nickel  
**P8717-31** Black  
**P9122-28** Bright White  
 Dead end closes open end of track. Two dead ends already supplied with track sections.



Cord & Plug Set

**P8724-31** Black  
**P9111-28** Bright White  
 Cord & plug set for feeding track where there is no outlet box. 15-foot cord. Includes 10 amp switch. Switch can be positioned anywhere along cord.\*



Fixture Adapter

**P8727-09** Brushed Nickel  
**P8727-28** Bright White  
**P8727-31** Black  
 Fixture adapter adapts cord-hung (max. wt. 10 lbs.) or chain-hung (max. wt. 25 lbs.) fixtures to Trak-1® or AlphaTrack®.



"Anywhere" Power Feed

**P8730-09** Brushed Nickel  
**P8730-31** Black  
**P9108-28** Bright White  
 "Anywhere" power feed snaps into place at any point along the track. Canopy kit required. Has 8" leads. Includes one P8717 dead end.\*



"Anywhere" Power Feed

**P8742-31** Black  
**P9121-28** Bright White  
 "Anywhere" power feed with 3/8" Greenfield connector. Has 72" of wire. Includes one P8717 dead end.\*



End Feed

**P8745-09** Brushed Nickel  
**P8745-28** Bright White  
**P8745-31** Black  
 Size: 4 - 1/2" sq.  
 End feed with flush canopy.



Top or End Feed

**P8746-09** Brushed Nickel  
**P8746-31** Black  
**P9110-28** Bright White  
 Top or end feed for Romex, 3/8" Greenfield or 1/2" EMT.



Outlet adapter

**P8751-09** Brushed Nickel  
**P8751-28** Bright White  
**P8751-31** Black  
 Outlet adapter. Grounded convenience outlet mounts on track. Max. 20 amps.\*



Canopy Kit – Flush Mount

**P8753-09** Brushed Nickel  
**P8753-31** Black  
**P9107-28** Bright White  
 Canopy Kit – Flush Mount. Mounting plate can be used anywhere along track. Slips between ceiling and track.




4" slotted outlet box for suspended ceilings

**P8770-01**  
 4" slotted outlet box for suspended ceilings. For use with P8760 and P9109 T-bar end feed. Mounts into T-bar grid cross section.\*



**P8760-09** Brushed Nickel  
**P8760-31** Black  
**P9109-28** Bright White  
 T-bar end feed with canopy cover for suspended ceilings. (Use P8770-01 slotted outlet box.)

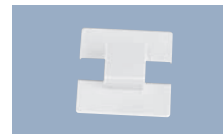

Floating Canopy

**P9123-09** Brushed Nickel  
**P9123-28** Bright White  
**P9123-31** Black  
 Floating canopy mounts anywhere on track, includes power feed and covers. Fits over standard outlet box. Includes one P8717 and P9122-28 dead end.



Suspended Ceiling Clips

**P8771-30** White  
 Suspended ceiling clips. Use two for 2' or 4' track sections. Three for 8' track. Five for 12' track. For mounting track sections onto T-bar grid.

## External 50w Electronic Transformer



P8516-09

**P8516-09** Brushed Nickel  
**P8516-30** White  
**P8516-31** Black  
 12V transformer. Mounts directly onto Progress Alpha Trak® system. Accommodates P8777 adapter for using Illuma-Flex™ mini-pendants with Alpha Trak® system.  
 Size: 1-3/8" W., 2-1/2" ht., 5" L.



P8516-30

\*Not UL listed.

progresslighting.com

## Alpha Trak® Mounting Options



### Monopoint



**P8734-09** Brushed Nickel  
**P8734-31** Black  
**P9113-28** Bright White  
 Monopoint mounts any lampholder, not requiring an external transformer, to junction box on ceiling or wall. Size: 5" dia., 1" ht.

### Adapters

**P8777-09** Brushed Nickel  
 Converting adapter for mounting Illuma-Flex™ products to Alpha-Trak® system. Included with all Illuma-Flex™ fixtures. Must be used with P8516 transformer.\*\*  
 Size: 7/8" W., 1-7/8" ht.  
 Max. weight 35 lbs.



P8777-09

**P8728-09** Brushed Nickel  
**P8728-28** White  
**P8728-31** Black  
 Alpha-Trak® stem-hung mini-pendant adapter. Size: 1-1/4" dia., 3-7/8" ht.  
 Max. weight 11 lbs.



P8728-09




P8728-28



P8728-31

## Pendant Kits

USED FOR SUSPENDING TRACK FROM HIGHER AND SLOPED CEILINGS. MAXIMUM SPACING BETWEEN PENDANTS IS 4 FEET. STEM WILL SUSPEND TRACK 6", 12" AND 18" FROM CEILING. 6" AND 12" STEM AND CONNECTORS PROVIDED. WILL HANG STRAIGHT FROM CEILING UP TO 45°

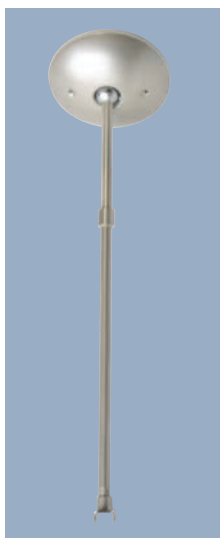

*Pendant Kit with Power Feed and 24" Wire*

**P8718-09** Brushed Nickel  
**P8718-28** Bright White  
**P8718-31** Black  
 Pendant kit (with power feed) and 24" wire includes outlet box cover, 6" and 12" stem lengths and all necessary mounting hardware.



*Pendant Kit Less Power Feed*

**P8715-09** Brushed Nickel  
**P8715-28** Bright White  
**P8715-31** Black  
 Pendant kit (less power feed) with outlet box cover, 6" and 12" stem lengths and all necessary mounting hardware.\*



**P9103-09**  
Track



**P8728-09**  
Adapter



**P5003-09**  
Pendant




OUTDOOR LIGHTING IS ONE OF THE MOST IMPORTANT ELEMENTS TO YOUR HOME'S DESIGN. FROM DECORATIVE WALL LANTERNS TO RECESSED OR LANDSCAPE LIGHTING, THERE ARE DOZENS OF WAYS TO INCORPORATE OUTDOOR FIXTURES TO ENHANCE YOUR HOMES CURB APPEAL.

ADDITIONALLY, WELL-LIT WALKWAYS, DRIVEWAYS AND PORCHES CREATE A SAFER AND MORE SECURE ENVIRONMENT FOR FAMILY AND GUESTS AS THEY ENTER AND EXIT YOUR HOME.





# Arrive

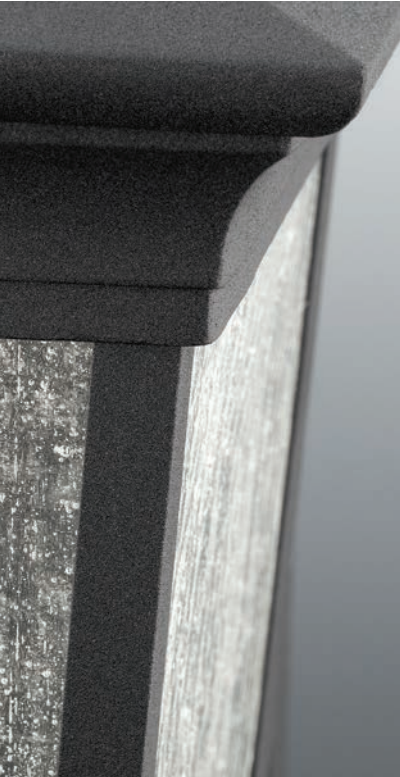

## SMALL WALL LANTERN

**P6067-3130K9** Black

Size: 6" W., 8-3/4" ht. Extends 7-3/8". H/CTR 4".

Lamp: One integral 9w LED module included.



## MEDIUM WALL LANTERN

**P6068-3130K9** Black

Size: 7-1/2" W., 11-1/8" ht. Extends 8-3/4". H/CTR 5-1/4".

Lamp: One integral 9w LED module included.



## LARGE WALL LANTERN

**P6069-3130K9** Black

Size: 9" W., 13" ht. Extends 10-1/4". H/CTR 5-3/4".

Lamp: One integral 17w LED module included.



P6067-3130K9



P6068-3130K9

## LED FEATURES

- 120v AC, replaceable module
- 1211 lumens, 71.2 lumens/watt  
9w: 623 lumens, 69.2 lumens/watt
- 3000K color temperature; 90 CRI
- Dimmable to 10% brightness with many ELV type dimmers
- ENERGY STAR and Title 24 Compliant (designated models)



P6069-3130K9



ARRIVE LED LANTERNS FEATURE A DIE-CAST ALUMINUM POWDER COATED FRAME AND HEAVILY TEXTURED GLASS TO CREATE A UNIQUE VISUAL EFFECT.



P6076-3130K9



P6527-3130K9



P6427-3130K9



P5258-31

#### EXTRA LARGE WALL LANTERN

**P6076-3130K9** Black

Size: 11" W., 16" ht. Extends 12-1/4". H/CTR 8-5/8".

Lamp: One integral 17w LED module included.



#### HANGING LANTERN

**P6527-3130K9** Black

Size: 9" sq., 15-1/8" ht.

Overall ht. w/chain 88-1/4"; wire 180".

Lamp: One integral 17w LED module included.



#### POST LANTERN

**P6427-3130K9** Black

Size: 9" sq., 15-7/8" ht. Fits 3" post (order separately).

Lamp: One integral 17w LED module included.



#### PATH LIGHT

**P5258-31** Black

Size: 5" dia., 6-1/2" ht.

Must use with transformer.

Lamp: One 12v T5 wedge base, 18w max., included.



See page 299 for additional chain, and page 628 for posts.

# Endorse



## SMALL WALL LANTERN

**P6056-3130K9** Black  
Size: 6-3/4" W., 12" ht. Extends  
7-5/8". H/CTR 3-1/4".  
Lamp: One integral 9w LED  
module included.



## MEDIUM WALL LANTERN

**P6057-3130K9** Black  
Size: 8-3/4" W., 14-3/4" ht.  
Extends 9-3/4". H/CTR 4".  
Lamp: One integral 9w LED  
module included.



## LARGE WALL LANTERN

**P6058-3130K9** Black  
Size: 10-3/4" W., 17-3/4" ht.  
Extends 11-3/4". H/CTR 4".  
Lamp: One integral 9w LED  
module included.



P6056-3130K9  
*Shown with P8774-31  
accessory column*



P6056-3130K9



P6058-3130K9



P6057-3130K9



P6057-3130K9  
*Shown with P8775-31  
accessory column*

## LED FEATURES

- 120v AC, replaceable module
- 623 lumens, 69.2 lumens/watt
- 3000K color temperature;  
90 CRI
- Dimmable to 10% brightness  
with many ELV type dimmers
- ENERGY STAR and Title 24  
Compliant

ENDORSE CELEBRATES THE TRADITIONAL FORM OF A GAS-POWERED COACH LIGHT WITH ILLUMINATION FROM A MODERN LED SOURCE. A DIE-CAST ALUMINUM, POWDER COATED FRAME CREATES AN INTRIGUING VISUAL EFFECT WITH CLEAR BEVELED GLASS. TO ADD A DECORATIVE ELEMENT IN THE LANTERN, A FLUTED FROSTED GLASS COLUMN IS OFFERED AS AN ACCESSORY.



#### HANGING LANTERN

**P6526-3130K9** Black

Size: 8-3/4" sq., 14-1/2" ht.  
Overall ht. w/chain 101";  
wire 180".

Lamp: One integral 9w LED  
module included.



#### ACCESSORY COLUMN

**P8774-31** Black

For use with P6056

Size: 2-3/4" sq., 9-5/8" ht.

#### ACCESSORY COLUMN

**P8775-31** Black

For use with P6057, P6526

Size: 2-3/4" sq., 12-3/8" ht.

#### ACCESSORY COLUMN

**P8779-31** Black

For use with P6058

Size: 2-3/4" sq., 15-1/4" ht.



TRADITIONAL / CLASSIC

PROGRESS **LED**

# Brookside LED

GET INSPIRED FROM VINTAGE UNDERTONES AND TRAIN STATION STYLING WITH THIS ENERGY EFFICIENT OUTDOOR LANTERN COLLECTION. AVAILABLE IN ALUMINUM WITH GILDED IRON FINISH OR SOLID BRASS WITH ANTIQUE NICKEL OR SOLID COPPER THAT AGES TO A PATINA FINISH. DARK SKY COMPLIANT.



## LARGE WALL LANTERN

**P5723-1430K9** Copper

**P5723-7130K9** Gilded Iron

**P5723-8130K9** Antique Nickel

Size: 12" W., 12-1/4" ht.

Extends 13-1/4". H/CTR 6-7/8".

Lamp: One integral 17w LED module included.



P5723-14



P5723-81

## LED FEATURES

- 120v AC, replaceable module
- 1211 lumens, 71.2 lumens/watt
- 3000K color temperature; 90 CRI
- Dimmable to 10% brightness with many ELV type dimmers
- ENERGY STAR and Title 24 Compliant



P5723-71

*For incandescent versions  
see pages 552-553.*

PROGRESS **LED**

# Derby LED

CRAFTSMAN STYLING MARRIES TRADITIONAL AND RUSTIC DETAILS. DERBY BOASTS AN ARTISTIC GLASS DIFFUSER WITH A DIE-CAST ALUMINUM, POWDER COATED ANTIQUE BRONZE FRAME.

## SMALL WALL LANTERN

**P5749-2030K9** Antique Bronze  
Size: 6-1/2" W., 8-3/8" ht.  
Extends 7-3/8". H/CTR 3".  
Lamp: One integral 9w LED module included.



## MEDIUM WALL LANTERN

**P5750-2030K9** Antique Bronze  
Size: 8-1/2" W., 11-1/4" ht.  
Extends 9-3/8". H/CTR 4-1/4".  
Lamp: One integral 9w LED module included.



## LARGE WALL LANTERN

**P5751-2030K9** Antique Bronze  
Size: 10-5/8" W., 15-1/2" ht.  
Extends 11-5/8". H/CTR 3-3/8".  
Lamp: One integral 9w LED module included.



## FLUSH MOUNT

**P6017-2030K9** Antique Bronze  
Size: 10" sq., 5-1/2" ht.  
Lamp: One integral 17w LED module included.



P6017-2030K9



P5750-2030K9



P5751-2030K9



P5749-2030K9

## LED FEATURES

- 120v AC, replaceable module
- 9w: 623 lumens, 69.2 lumens/watt  
17w: 1211 lumens, 71.2 lumens/watt
- 3000K color temperature; 90 CRI
- Dimmable to 10% brightness with many ELV type dimmers
- ENERGY STAR and Title 24 Compliant



# Westport LED



P3883-2030K9



P3883-3130K9



P5862-2030K9



P5862-3030K9



P5864-3130K9



P5864-2030K9

## LED FEATURES

- 120v AC, replaceable module
- 9w: 623 lumens, 69.2 lumens/watt  
17w: 1211 lumens, 71.2 lumens/watt
- 3000K color temperature; 90 CRI
- Dimmable to 10% brightness with ELV type dimmers
- ENERGY STAR and Title 24 Compliant (designated models)

## WALL LANTERN

**P5862-2030K9** Antique Bronze  
**P5862-3030K9** White  
**P5862-3130K9** Black  
Size: 6-7/8" W., 10-1/4" ht.  
Extends 8-3/8". H/CTR 3-1/8".  
Lamp: One integral 9w LED module included.



## WALL LANTERN

**P5864-2030K9** Antique Bronze  
**P5864-3030K9** White  
**P5864-3130K9** Black  
Size: 11" W., 15-3/8" ht.  
Extends 12-7/8". H/CTR 4".  
Lamp: One integral 17w LED module included.



## FLUSH MOUNT

**P3883-2030K9** Antique Bronze  
**P3883-3030K9** White  
**P3883-3130K9** Black  
Size: 9" dia., 7-1/4" ht.  
Lamp: One integral 17w LED module included.



WESTPORT LED OFFERS TRADITIONAL STYLING TO COMPLEMENT A VARIETY OF HOME DÉCOR OPTIONS. A DURABLE, DIE-CAST ALUMINUM FRAME CRADLES A SOFTLY DIFFUSED, SEEDED GLASS SHADE

P5863-2030K9



P5863-3130K9



P5530-3030K9



P5530-3130K9



#### POST LANTERN

**P5445-2030K9** Antique Bronze

**P5445-3030K9** White

**P5445-3130K9** Black

Size: 9" dia., 16-3/8" ht. Fits 3" post (order separately).

Lamp: One integral 9w LED module included.



#### HANGING LANTERN

**P5530-2030K9** Antique Bronze

**P5530-3030K9** White

**P5530-3130K9** Black

Size: 9" dia., 11-3/4" ht. Overall ht. w/chain 88"; wire 180".

Lamp: One integral 9w LED module included.



#### WALL LANTERN

**P5863-2030K9** Antique Bronze

**P5863-3030K9** White

**P5863-3130K9** Black

Size: 9" W., 12-7/8" ht.

Extends 10-3/8". H/CTR 3-3/4".

Lamp: One integral 9w LED module included.



P5445-3130K9



P5445-2030K9



See page 299 for additional chain, and page 628 for posts.

# Cadence



## EXTRA LARGE WALL LANTERN

**P6083-31** Black  
Size: 12-1/4" W., 32" ht.  
Extends 13-3/4".  
H/CTR 14-1/4".  
Lamp: One medium base  
lamp, 100w max.

## POST LANTERN

**P6435-31** Black  
One-light post lantern.  
Size: 10" sq., 22-5/8" ht. Fits  
3" post (order separately).  
Lamp: One medium base  
lamp, 100w.

## HANGING LANTERN

**P6535-31** Black  
Size: 10" sq., 24" ht. Overall ht.  
w/chain 99-1/4"; wire 180".  
Lamp: One medium base  
lamp, 100w max.



P6535-31



P6083-31



P6435-31

JUST LIKE A MUSICAL CADENCE, DETAILS OF THIS LANTERN FEATURE SOOTHING INFLECTIONS OF DESIGN ELEMENTS. CADENCE OFFERS A DECORATIVE AND FASHION-ORIENTED DESIGN WITH MODERN CLASSICAL STYLING. FROSTED SEEDED GLASS WITH OVERLAY AND DIE-CAST ALUMINUM, POWDER COATED FRAME ADDS INTRIGUE TO WALL, HANGING AND POST OPTIONS, WITH LARGE-SCALE SIZES AVAILABLE.



#### SMALL WALL LANTERN

**P6080-31** Black

Size: 6" W., 16-1/4" ht.

Extends 7-1/4". H/CTR 7-3/4".

Lamp: One medium base lamp, 100w max.

#### MEDIUM WALL LANTERN

**P6081-31** Black

Size: 8" W., 21-1/4" ht.

Extends 9-3/8". H/CTR 9-7/8".

Lamp: One medium base lamp, 100w max.

#### LARGE WALL LANTERN

**P6082-31** Black


Size: 10" W., 26-5/8" ht. Extends

11-1/2". H/CTR 12-1/4".

Lamp: One medium base lamp, 100w max.

See page 299 for additional chain,  
and page 628 for posts.

# Crawford

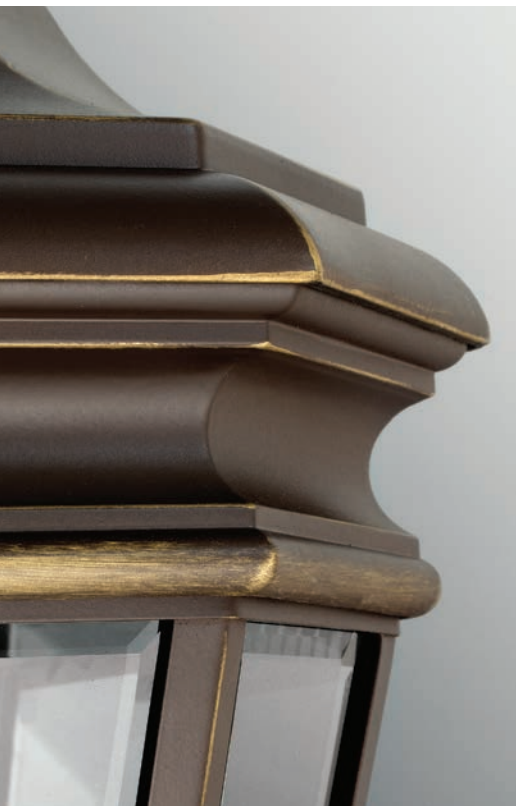

## POST LANTERN

**P5474-108** Oil Rubbed Bronze  
Size: 12" dia., 28-1/2" ht.  
Fits 3" post (order separately).  
Lamps: Four candelabra base  
lamps, each 60w max.

## HANGING LANTERN

**P5574-108** Oil Rubbed Bronze  
Size: 12" dia., 29-3/8" ht.  
Overall ht. w/ chain 68"; wire 15'.  
Lamps: Four candelabra base  
lamps, each 60w max.



P5474-108



P5574-108



TRANSFORM THE OUTDOORS WITH TIMELESS STYLING. CAST LANTERNS WITH CLEAR BEVELED GLASS AND OIL RUBBED BRONZE FINISH. HINGED DOOR FOR EASY RELAMPING.



P5673-108



P5670-108



P5672-108



P5671-108

#### SMALL WALL LANTERN

**P5670-108** Oil Rubbed Bronze  
Size: 6-1/2" W., 12-1/2" ht.  
Extends 8-3/4". H/CTR 8".  
Lamp: One medium base lamp,  
100w max.

#### MEDIUM WALL LANTERN

**P5671-108** Oil Rubbed Bronze  
Size: 8-1/2" W., 16-3/4" ht.  
Extends 11-1/8" H/CTR 9-5/8".  
Lamps: Two candelabra base lamps,  
each 60w max.

#### LARGE WALL LANTERN

**P5672-108** Oil Rubbed Bronze  
Size: 10" W., 29" ht.  
Extends 12-1/2". H/CTR 11-5/8".  
Lamps: Three candelabra base lamps,  
each 60w max.

#### EXTRA LARGE WALL LANTERN

**P5673-108** Oil Rubbed Bronze  
Size: 12" W., 32-3/4" ht.  
Extends 14-3/4". H/CTR 14-3/4".  
Lamps: Four candelabra base lamps,  
each 60w max.

See page 299 for additional chain,  
and page 628 for posts.


# RESORT

## HANGING LANTERN

**P6504-122** Aged Copper  
Decorative bottom grill included.  
Size: 8-1/2" dia., 14-1/8" ht.  
Overall ht. w/chain 88"; wire 15'.  
Lamp: One medium base lamp,  
100w max.

## DECORATIVE GRILL

**P8789-122** Aged Copper  
Decorative Grill for (8.5") Wall  
Lantern (P5988-122)  
Size: 7-1/4" dia., 3/16" ht.

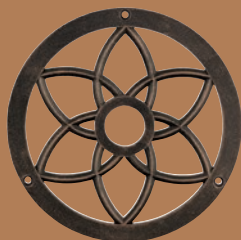

Grill included with  
P6504-122



Shown P6504-122 hanging lantern, P5988-122 wall lantern  
and P6404-122 post lantern.





P5988-122

#### LARGE WALL LANTERN

**P5989-122** Aged Copper  
Size: 10-1/2" W., 19-3/4" ht.  
Extends 14". H/CTR 5-7/8".  
Lamp: One medium base lamp,  
100w max.



#### SMALL WALL LANTERN

**P5987-122** Aged Copper  
Size: 6-1/2" W., 10-7/8" ht.  
Extends 7-1/2". H/CTR 3-1/2".  
Lamp: One medium base lamp,  
100w max.

#### POST LANTERN

**P6404-122** Aged Copper  
Decorative bottom grill.  
Size: 8-1/2" dia., 17-3/8" ht. Fits  
3" post (order separately).  
Lamp: One medium base lamp,  
100w max.

#### MEDIUM WALL LANTERN

**P5988-122** Aged Copper  
Size: 8-1/2" W., 15-7/8" ht.  
Extends 11-1/4". H/CTR 4-3/4".  
Lamp: One medium base lamp,  
100w max.

#### EXTRA LARGE WALL LANTERN

**P6606-122** Aged Copper  
Size: 12-1/2" W., 23-1/2" ht.  
Extends 16-5/8". H/CTR 7-5/8".  
Lamp: One medium base lamp,  
100w max.



P5987-122



P5989-122



P6606-122

# MERIDIAN

DECORATIVE SHEPHERD HOOKS AND ACANTHUS CAST ARMS. CLEAR SEEDED GLASS URNS IN BLACK FINISH.



P5822-31



P5824-31



P5520-31



P5420-31

## POST LANTERN

**P5420-31** Black  
Size: 12" dia., 26" ht.  
Fits 3" post (order separately).  
Lamps: Three candelabra base lamps, each 60w max.

## HANGING LANTERN

**P5520-31** Black  
Size: 12" dia., 24-1/4" ht.  
Overall ht. w/chain 99"; wire 15'  
Lamps: Three candelabra base lamps, each 60w max.

## SMALL WALL LANTERN

**P5820-31** Black  
Size: 6-3/4" W., 15" ht. Extends 9-5/8". H/CTR 5-1/2".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P5822-31** Black  
Size: 9" W., 20-1/4" ht. Extends 12-1/2". H/CTR 7-1/2".  
Lamps: Two candelabra base lamps, each 60w max.

## MEDIUM WALL LANTERN

**P5823-31** Black  
Size: 9" W., 19-3/4" ht. Extends 12-1/2". H/CTR 10".  
Lamps: Two candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5824-31** Black  
Size: 12" W., 27" ht. Extends 16-1/2". H/CTR 8-1/4".  
Lamps: Three candelabra base lamps, each 60w max.



P5820-31



P5823-31



SCROLLING CAST ARMS, FLUTED BODIES AND ACORN ACCENTS. CLEAR SEEDED GLASS WITH GILDED IRON OR FORGED BRONZE POWDER COAT FINISH. CAST ALUMINUM AND BRASS CONSTRUCTION.

# NOTTINGTON

## POST LANTERN

**P5438-71** Gilded Iron  
**P5438-77** Forged Bronze  
 Size: 10" dia., 22-1/2" ht.  
 Fits 3" post (order separately).  
 Lamps: Three candelabra base lamps, each 60w max.

## HANGING LANTERN

**P5538-71** Gilded Iron  
**P5538-77** Forged Bronze  
 Size: 10" dia., 23-3/4" ht.  
 Overall ht. w/chain 63"; wire 15'  
 Lamps: Three candelabra base lamps, each 60w max.

## MEDIUM WALL LANTERN

**P5835-71** Gilded Iron  
**P5835-77** Forged Bronze  
 Size: 8" W., 19-5/8" ht.  
 Extends 10-5/8". H/CTR 10-5/8".  
 Lamps: Two candelabra base lamps, each 60w max.

## MEDIUM WALL LANTERN

**P5836-71** Gilded Iron  
**P5836-77** Forged Bronze  
 Size: 8" W., 19-5/8" ht.  
 Extends 10-5/8". H/CTR 8".  
 Lamps: Two candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5837-71** Gilded Iron  
**P5837-77** Forged Bronze  
 Size: 10" W., 26" ht.  
 Extends 13". H/CTR 9-1/2".  
 Lamps: Three candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5838-71** Gilded Iron  
**P5838-77** Forged Bronze  
 Size: 10" W., 24-1/2" ht.  
 Extends 13". H/CTR 14-7/8".  
 Lamps: Three candelabra base lamps, each 60w max.

See page 299 for additional chain,  
 and page 628 for posts.

P5538-71



P5837-71



P5836-71



P5835-77



P5838-77



P5438-77



# Ashmore



P5653-20



P5653-31



P5652-31



P5550-20



P5550-31

## HANGING LANTERN

**P5550-20** Antique Bronze

**P5550-31** Textured Black

Size: 9-5/8" dia., 17-3/4" ht.

Overall ht. w/ chain 92"; wire 10'.

Lamps: Three candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5652-20** Antique Bronze

**P5652-31** Textured Black

Size: 8-5/8" dia., 26-1/2" ht.

Extends 12-3/8". H/CTR 19-1/8".

Lamps: Three candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5653-20** Antique Bronze

**P5653-31** Textured Black

Size: 9-5/8" dia., 27-1/2" ht.

Extends 12-3/4". H/CTR 20-1/2".

Lamps: Three candelabra base lamps, each 60w max.

## SMALL WALL LANTERN

**P5854-20** Antique Bronze

**P5854-31** Textured Black

Motion sensor wall lantern.

Size: 6-5/8" W., 15" ht.

Extends 9-5/8". H/CTR 10-1/4".

Lamp: Two candelabra base lamps, each 60w max.



P5854-20



P5854-31

Also available as CFL with etched waterglass. See page 598.

HANDSOME DETAILS, QUILL-SCROLLED ARMS AND DECORATIVE FINIALS. TEXTURED BLACK OR ANTIQUE BRONZE FINISH. DIE-CAST ALUMINUM CONSTRUCTION WITH WATER SEEDED GLASS.

#### PATH LIGHT

**P5250-20** Antique Bronze

**P5250-31** Textured Black

Requires transformer.

Size: 6-1/2" W., 25-1/2" ht.

Lamp: One 12V T5 wedge base, 18w max. (included).



#### POST LANTERN

**P5450-20** Antique Bronze

**P5450-31** Textured Black

Size: 9-5/8" dia., 23-3/4" ht.

Fits 3" post (order separately).

Lamps: Three candelabra base lamps, each 60w max.

#### FLUSH MOUNT

**P5562-20** Antique Bronze

**P5562-31** Textured Black

Size: 10-5/8" dia., 9-3/4" ht.

Lamps: Two candelabra base lamps, each 60w max.

#### SMALL WALL LANTERN

**P5649-20** Antique Bronze

**P5649-31** Textured Black

Size: 6-5/8" dia., 14-7/8" ht.

Extends 9-3/8". H/CTR 4-1/2".

Lamps: Two candelabra base lamps, each 60w max.

#### MEDIUM WALL LANTERN

**P5650-20** Antique Bronze

**P5650-31** Textured Black

Size: 8-5/8" dia., 16-1/2" ht.

Extends 10-3/8". H/CTR 4-1/2".

Lamps: Three candelabra base lamps, each 60w max.

#### LARGE WALL LANTERN

**P5651-20** Antique Bronze

**P5651-31** Textured Black

Size: 9-5/8" dia., 20-1/2" ht.

Extends 12-3/4". H/CTR 7".

Lamps: Three candelabra base lamps, each 60w max.



P5562-31



P5450-20



P5450-31



P5649-31



P5651-20



P5450-20



P5450-31



P5250-20



P5250-31

See page 298 for additional chain,  
and page 628 for posts.

# Salute

ETCHED UMBER GLASS CAGE TOPPED WITH FLOWING CURVED HOOD. ALUMINUM CONSTRUCTION WITH A POWDER COAT FINISH IN OIL RUBBED BRONZE.



## POST LANTERN

**P5453-108** Oil Rubbed Bronze  
Size: 8-1/2" sq., 23-1/8" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P5554-108** Oil Rubbed Bronze  
Size: 8-1/2" sq., 20-5/8" ht.  
Overall ht. w/chain 96";  
wire 15'.  
Lamp: One medium base lamp, 100w max.

## SMALL WALL LANTERN

**P5953-108** Oil Rubbed Bronze  
Size: 5-3/4" W., 14-3/8" ht.  
Extends 6-1/8". H/CTR 9-7/8".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P5954-108** Oil Rubbed Bronze  
Size: 7-1/4" W., 17-3/4" ht.  
Extends 7-5/8". H/CTR 12".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5955-108** Oil Rubbed Bronze  
Size: 8-1/2" W., 20-5/8" ht.  
Extends 8-7/8". H/CTR 13-7/8".  
Lamp: One medium base lamp, 100w max.



P5955-108



P5453-108



# Meadowlark

ARCHED ROOF, TOP RIBBON SCROLLED LOOPS AND ARCHING ARMS WITH WATER SEEDED GLASS. CAST ALUMINUM CONSTRUCTION WITH POWDER COAT FINISH IN OIL RUBBED BRONZE.



P5715-108



P5716-108

## POST LANTERN

**P5468-108** Oil Rubbed Bronze  
Size: 6-7/8" L., 8-1/2" W., 17-7/8" ht. Fits 3" post (order separately).  
Lamps: Three candelabra base lamps, each 60w max.

## HANGING LANTERN

**P5502-108** Oil Rubbed Bronze  
Size: 8-1/2" W., 6-7/8" L., 15" ht. Overall ht. w/chain 90", wire 15'.  
Lamps: Three candelabra base lamps, each 60w max.

## SMALL WALL LANTERN

**P5715-108** Oil Rubbed Bronze  
Size: 6-3/8" W., 12" ht. Extends 6-7/8". H/CTR 7-5/8".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P5716-108** Oil Rubbed Bronze  
Size: 7-1/4" W., 14-1/2" ht. Extends 8-1/4". H/CTR 7-3/4".  
Lamps: Two candelabra base lamps, each 60w max.

## LARGE WALL LANTERN

**P5717-108** Oil Rubbed Bronze  
Size: 8-1/2" W., 17-1/8" ht. Extends 9-5/8". H/CTR 9".  
Lamps: Three candelabra base lamps, each 60w max.



P5502-108



P5468-108

See page 298 for additional chain, and page 628 for posts.

# PRESTWICK



P5921-108



P5484-108

## POST LANTERN

**P5484-108** Oil Rubbed Bronze  
Size: 10-3/4" dia., 18-3/4" ht.  
Fits 3" post (order separately).  
Lamps: Three candelabra base  
lamps, each 60w max.

## SMALL WALL LANTERN

**P5920-108** Oil Rubbed Bronze  
Size: 6-7/8" W., 11" ht.  
Extends 8". H/CTR 5-1/4".  
Lamp: One medium base  
lamp, 100w max.

## MEDIUM WALL LANTERN

**P5921-108** Oil Rubbed Bronze  
Size: 8-3/4" W., 13-7/8" ht.  
Extends 10". H/CTR 6-3/4".  
Lamps: Two candelabra base  
lamps, each 60w max.



Shown: P5923-108 lanterns.



P5920-108





CLASSIC ROOFLINES AND UNIQUE CAST YOKE STRAPS IN OIL RUBBED BRONZE FINISH. WATER GLASS URN SHADE.



#### HANGING LANTERN

**P5584-108** Oil Rubbed Bronze  
Size: 10-3/4" dia., 17-3/4" ht.  
Overall ht. w/chain 93",  
wire 15'.  
Lamps: Three candelabra base  
lamps, each 40w max.

**LARGE WALL LANTERN**  
**P5923-108** Oil Rubbed Bronze  
Size: 10-3/4" W., 16-3/4" ht.  
Extends 12". H/CTR 7-7/8".  
Lamps: Three candelabra base  
lamps, each 60w max.



See page 298 for additional chain,  
and page 628 for posts.

A GRACIOUS CAST PATTERN. CLEAR SEEDED GLASS WITH DELICATE, DECORATIVE PAISLEY SCROLLED DETAILS. CAST ALUMINUM CONSTRUCTION WITH DURABLE POWDER COAT ESPRESSO FINISH.

# ENCHANT



## MEDIUM WALL LANTERN

**P5959-84** Espresso  
Size: 8-1/8" sq., 15-1/8" ht.  
Extends 10". H/CTR 5-3/4".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5966-84** Espresso  
Size: 9-1/2" sq., 18-5/8" ht.  
Extends 12". H/CTR 8-3/4".  
Lamp: One medium base lamp, 100w max.

## SMALL WALL LANTERN

**P5967-84** Espresso  
Size: 6" sq., 10" ht.  
Extends 7-1/2". H/CTR 4-1/4".  
Lamp: One medium base lamp, 100w max.

## EXTRA-LARGE WALL LANTERN

**P5996-84** Espresso  
Size: 11" sq., 21-3/4" ht.  
Extends 14". H/CTR 10".  
Lamp: One medium base lamp, 100w max.

## POST LANTERN

**P6401-84** Espresso  
Size: 9-1/2" sq., 20-3/4" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6501-84** Espresso  
Size: 9-1/2" sq., 15" ht.  
Overall ht. w/chain 87"; wire 15'.  
Lamp: One medium base lamp, 100w max.



P6501-84



P5996-84



P5966-84



P6401-84



P5967-84



P5959-84



# Andover

BEVELED GLASS PANELS. DIE-CAST ALUMINUM CONSTRUCTION IN AN ANTIQUE BRONZE FINISH.

## POST LANTERN\*

**P5487-20** Antique Bronze  
Size: 9-1/2" sq., 21-1/2" ht  
Fits 3" post (order separately).  
Lamps: Three candelabra base lamps, each 60w max.

## HANGING LANTERN\*

**P5587-20** Antique Bronze  
Size: 9-1/2" sq., 20" ht.  
Overall ht. w/chain 94"; wire 10'.  
Lamps: Three candelabra base lamps, each 60w max.

## SMALL WALL LANTERN

**P5687-20** Antique Bronze  
Size: 5-1/2" W., 12-3/4" ht.  
Extends 6-1/4". H/CTR 6-1/4".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN\*

**P5688-20** Antique Bronze  
Size: 7-1/2" W., 21-1/4" ht.  
Extends 8-1/4". H/CTR 7-1/2".  
Lamps: Two candelabra base lamps, each 60w max.

## LARGE WALL LANTERN\*

**P5689-20** Antique Bronze  
Size: 9-1/2" W., 26-1/4" ht.  
Extends 10-1/4". H/CTR 9".  
Lamps: Three candelabra base lamps, each 60w max.

\* Hinged door for easy relamping.

P5587-20



P5689-20



P5487-20



P5687-20



P5688-20

See page 299 for additional chain,  
and page 628 for posts.

# Coventry



P5828-31



P5828-87



## MEDIUM WALL LANTERN

**P5828-31** Textured Black

**P5828-87** Fieldstone

Size: 8" W., 17-1/4" ht.

Extends 10". H/CTR 10".

Lamp: One medium base lamp,  
100w max.

*Shown: P5829-87 lanterns.*



CAPTURE THE ROMANCE WITH  
OPTIC HAMMERED GLASS, STYLIZED  
CAP AND SHEPHERD'S CROOK. DIE-  
CAST ALUMINUM CONSTRUCTION.



#### PATH LIGHT

**P5275-31** Textured Black  
Low voltage. Use with  
transformer.  
Size: 5-3/4" W., 25" ht.  
Lamp: One 18w T5  
wedge base (included).



#### POST LANTERN

**P5429-31** Textured Black  
**P5429-87** Fieldstone  
Size: 9-3/4" dia. 19-5/8" ht.  
Fits 3" post (order separately).  
Lamps: Two candelabra base  
lamps, each 60w max.



P5529-31



P5529-87



P5829-87



P5829-31



P5429-31



P5275-31

#### MEDIUM WALL LANTERN

**P5829-31** Textured Black  
**P5829-87** Fieldstone  
Size: 9-3/4" W., 20-1/2" ht.  
Extends 12-1/2". H/CTR 12".  
Lamps: Two candelabra base  
lamps, each 60w max.

#### HANGING LANTERN

**P5529-31** Textured Black  
**P5529-87** Fieldstone  
Size: 9-3/4" dia., 19-1/4" ht.  
Overall ht. w/chain 94"; wire 10".  
Lamps: Two candelabra base  
lamps, each 60w max.





P5722-81



P5722-71



P5722-14

**MEDIUM WALL LANTERN**

**P5722-14** Copper

**P5722-71** Gilded Iron

**P5722-81** Antique Nickel

Size: 10" W., 10-3/4" ht.

Extends 11-3/4". H/CTR 6-1/2".

Lamp: One medium base lamp,  
75w max.



*Shown: P5723-81 lanterns.*

GET INSPIRED WITH VINTAGE UNDERTONES REMINISCENT OF EARLY 20<sup>TH</sup> CENTURY TRAIN DEPOTS. CAST ALUMINUM WITH GILDED IRON FINISH; SOLID BRASS WITH ANTIQUE NICKEL FINISH OR SOLID COPPER THAT AGES TO A PATINA FINISH. DARK SKY FRIENDLY.

# Brookside



SMALL WALL LANTERN

LARGE WALL LANTERN

**P5721-14** Copper  
**P5721-71** Gilded Iron  
**P5721-81** Antique Nickel  
 Size: 8" W., 9-3/4" ht.  
 Extends 9-3/4". H/CTR 5-3/4".  
 Lamp: One medium base  
 lamp, 60w max.

**P5723-14** Copper  
**P5723-71** Gilded Iron  
**P5723-81** Antique Nickel  
 Size: 12" W., 12-3/8" ht.  
 Extends 13-1/8". H/CTR 6-7/8".  
 Lamp: One medium base  
 lamp, 100w max.



P5723-14



P5723-81



P5723-71



P5721-81



P5721-14



P5721-71

For LED versions see page 530.



# Derby

DERBY BOASTS A COMBINATION OF ESPRESSO AND TEXTURED BLACK POWDER COAT FINISHES. FEATURES A BLOWN, CLEAR SEEDED GLASS DIFFUSER ENCASED IN A CAST ALUMINUM BLACK FRAME. ESPRESSO FINISH ON ROOF AND BACK PLATE.

## POST LANTERN

**P5479-84** Espresso

Size: 8-1/2" dia., 13-3/8" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P5579-84** Espresso

Size: 8-1/2" dia., 12-3/8" ht.,  
Overall ht. w/chain 86";  
wire 15'.  
Lamp: One medium base lamp, 100w max.

## SMALL WALL LANTERN

**P5749-84** Espresso

Size: 6-1/2" W., 8-3/8" ht.  
H/CTR 3". Extends 7-5/8".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P5750-84** Espresso

Size: 8-1/2" W., 11" ht.  
H/CTR 4-1/4". Extends 9-5/8".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5751-84** Espresso

Size: 10-5/8" W., 15" ht.  
H/CTR 3-3/8". Extends 14-1/8".  
Lamp: One medium base lamp, 100w max.

## FLUSH MOUNT

**P6017-84** Espresso

Size: 10" sq., 5-1/2" ht.  
Lamps: Two medium base lamps, each 60w max.



P5579-84



P6017-84



P5750-84



P5749-84



P5751-84



P5479-84

# Residence

A RICH EARTHY PALETTE, GEOMETRIC DETAILS AND TEXTURED ART GLASS CHARACTERIZE RESIDENCE – A TRULY CRAFTSMAN STYLE WITH A DIE-CAST ALUMINUM, POWDER COATED FRAME.



P6055-20



P6552-20



P6052-20



P6053-20



P6452-20



P6054-20

## SMALL WALL LANTERN

**P6052-20** Antique Bronze  
Size: 6" W., 9-1/4" ht.  
Extends 6-7/8". H/CTR 3-1/2".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P6053-20** Antique Bronze  
Size: 8" W., 12-3/8" ht.  
Extends 9". H/CTR 5".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P6054-20** Antique Bronze  
Size: 10" W., 15-1/8" ht.  
Extends 11-1/8". H/CTR 5-5/8".  
Lamp: One medium base lamp, 100w max.

## FLUSH MOUNT

**P6055-20** Antique Bronze  
Size: 12" W., 5" ht.  
Lamps: Two medium base lamps, 75w max.

## POST LANTERN

**P6452-20** Antique Bronze  
Size: 8" W., 15-3/4" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6552-20** Antique Bronze  
Size: 8" sq., 12-5/8" ht.  
Overall ht. w/ chain 86-1/4"; wire 120".  
Lamp: One medium base lamp, each 100w max.

See page 298 for additional chain,  
and page 628 for posts.

# Merit

SQUARE ETCHED GLASS SHADE WITHIN RECTILINEAR FRAME. CAST ALUMINUM CONSTRUCTION. FRAME SHOWCASES PIERCED GRID PATTERN. BLACK POWDER COAT FINISH.



## SMALL WALL LANTERN

**P6000-31** Black  
Size: 5-1/4" sq., 8" ht.  
Extends 6-1/4". H/CTR 2-1/2".  
Lamp: One medium base lamp, 60w max.

## MEDIUM WALL LANTERN

**P6001-31** Black  
Size: 7-3/4" sq., 12-1/4" ht.  
Extends 9". H/CTR 3".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P6002-31** Black  
Size: 10" sq., 15-3/4" ht.  
Extends 11-3/8". H/CTR 4".  
Lamp: One medium base lamp, 100w max.

## POST LANTERN

**P6400-31** Black  
Size: 10" sq., 18-3/4" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6500-31** Black  
Size: 10" sq., 17" ht.  
Overall ht. w/chain 91"; wire 120".  
Lamp: One medium base lamp, 100w max.



P6001-31



P6000-31



P6002-31



P6400-31



# Mac

CLASSIC ARTS AND CRAFTS  
INSPIRED PROFILE. CAST  
ALUMINUM CONSTRUCTION. CLEAR  
WATER GLASS AND DECORATIVE  
BOTTOM DETAIL. TEXTURED BLACK  
POWDER COATED FINISH.



P5559-31



Bottom Detail



P6023-31



P5906-31



P5907-31

## POST LANTERN

**P5459-31** Black  
Size: 8-1/2" sq., 16-1/2" ht.  
Fits 3" post (order  
separately).  
Lamp: One medium base  
lamp, 100w max.

## HANGING LANTERN

**P5559-31** Black  
Size: 8-1/2" sq., 14-7/8" ht.,  
Overall ht. w/chain 87";  
wire 15'.  
Lamp: One medium base  
lamp, 100w max.

## FLUSH MOUNT

**P6023-31** Black  
Size: 11" sq., 7" ht.  
Lamp: Two medium base  
lamp, 100w max.

## SMALL WALL LANTERN

**P5906-31** Black  
Size: 6" sq., 8-1/2" ht.  
Extends 7-1/8". H/CTR 5".  
Lamp: One medium base  
lamp, 100w max.

## MEDIUM WALL LANTERN

**P5907-31** Black  
Size: 8-3/4" sq., 12-1/4" ht.  
Extends 10-1/8". H/CTR 6-3/4".  
Lamp: One medium base  
lamp, 100w max.

## LARGE WALL LANTERN

**P5999-31** Black  
Size: 11" sq., 16-3/4" ht.  
H/CTR 7-3/4".  
Lamp: One medium base  
lamp, 100w max.



P5999-31



P5459-31

See page 298 for additional chain,  
and page 628 for posts.

# Prairie



UNIQUE CANTILEVERED ARMS, DISTINCTIVE  
ROOF AND CLEAR SEEDED GLASS.  
ALUMINUM AND BRASS CONSTRUCTION  
IN BRUSHED NICKEL, GILDED IRON OR  
BURNISHED CHESTNUT FINISHES.



P5763-86



P5763-09



P5763-71

#### POST LANTERN

**P5463-09** Brushed Nickel

**P5463-71** Gilded Iron

**P5463-86** Burnished Chestnut

Size: 13-3/4" W., 18-3/4" ht.

Fits 3" post (order separately).

Lamp: One medium base lamp,  
100w max.

#### SMALL WALL LANTERN

**P5763-09** Brushed Nickel

**P5763-71** Gilded Iron

**P5763-86** Burnished Chestnut

Size: 6-3/8" W., 9-1/8" ht.

Extends 8-1/2". H/CTR 5-1/4".

Lamp: One medium base lamp,  
100w max.

#### HANGING LANTERN

**P5563-09** Brushed Nickel

**P5563-71** Gilded Iron

**P5563-86** Burnished Chestnut

Size: 10" dia., 12-1/2" ht.

Overall ht. w/chain 52"; wire 15'.

Lamp: One medium base lamp,  
100w max.

#### MEDIUM WALL LANTERN

**P5764-09** Brushed Nickel

**P5764-71** Gilded Iron

**P5764-86** Burnished Chestnut

Size: 10" W., 13-1/2" ht.

Extends 12-1/2". H/CTR 7-1/2".

Lamp: One medium base lamp,  
100w max.



P5463-09



P5463-86



P5463-71

See page 298 for additional chain,  
and page 628 for posts.



# Arts & Crafts

REMINISCE UNDER LIGHTING INSPIRED BY THE BUNGALOWS OF THE 1900'S. CHARMING HIGHLIGHTS INCLUDE HIPPED-PITCH ROOF AND FRAME. HONEY ART GLASS WITH WEATHERED BRONZE FINISH. DIE-CAST ALUMINUM CONSTRUCTION.



## PATH LIGHT

**P5272-46** Weathered Bronze  
Low voltage path light.  
(Requires transformer).  
Size: 5-1/2" W., 7-1/2" ht.  
Extends 6-1/2".  
Lamp: One 18w T5 wedge base lamp (included).



## MEDIUM WALL LANTERN

**P5628-46** Weathered Bronze  
Size: 6-5/8" W., 10-1/2" ht.  
Extends 7-1/2". H/CTR 2-1/4".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5629-46** Weathered Bronze  
Size: 10" W., 15-1/4" ht.  
Extends 10-3/4". H/CTR 10".  
Lamp: One medium base lamp, 150w max.



## POST LANTERN

**P5428-46** Weathered Bronze  
Size: 10" W., 18-1/8" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp, 150w max.

## HANGING LANTERN

**P5528-46** Weathered Bronze  
Size: 10" W., 15-1/4" ht.  
Overall ht. w/chain 52"; wire 10'.  
Lamp: One medium base lamp, 150w max.

*Chandelier*  
pg 114



*Close-to-ceiling*  
pg 311



# Mission

RELAX IN AN OUTDOOR SETTING WITH HANDSOME LANTERNS. LIGHT HONEY ART GLASS WITH WEATHERED BRONZE FINISH.



P5768-46



P5759-46



P5262-46



P5261-46



P5461-46

## PATH LIGHT

**P5261-46** Weathered Bronze  
(Requires transformer).

Size: 6-1/2" sq., 3-5/8" ht.

Overall length 19-3/8".

Lamp: One 18w T5 wedge base lamp (included).



## DECK LANTERN

**P5262-46** Weathered Bronze  
Rail mount lantern. Fits 4" x 4" post or flush mount. (Requires transformer).

Size: 6-1/2" sq., 5-1/2" ht.

Lamp: One 18w T5 wedge base lamp (included).



## POST LANTERN

**P5461-46** Weathered Bronze

Size: 14" sq., 13-3/4" ht.

Fits 3" post (order separately).

Lamp: One medium base lamp, 150w max.

## SMALL WALL LANTERN

**P5759-46** Weathered Bronze

Size: 4-1/2" W., 8-1/2" ht.

Extends 4-3/4". H/CTR 5-1/8".

Lamp: One medium base lamp, 75w max.

## MEDIUM WALL LANTERN

**P5768-46** Weathered Bronze

Size: 14" W., 11-3/4" ht.

Extends 4-3/4". H/CTR 7".

Lamps: Two medium base lamps, each 60w max.

See page 299 for additional chain,  
and page 628 for posts.



# PENFIELD



P5897-108



## HANGING LANTERN

**P5503-108** Oil Rubbed Bronze

Size: 8" dia., 14-1/4" ht.

Overall ht w/chain 89";  
wire 15'.

Lamp: One medium base  
lamp, 100w max.

## SMALL WALL LANTERN

**P5895-108** Oil Rubbed Bronze

Size: 6-1/2" W., 9-3/4" ht.

Extends 8-1/2". H/CTR 5".

Lamp: One medium base  
lamp, 100w max.

## LARGE WALL LANTERN

**P5897-108** Oil Rubbed Bronze


Size: 9-3/4" W., 13-1/4" ht.

Extends 12-1/4". H/CTR 6-3/4".

Lamp: One medium base  
lamp, 100w max.

*Shown: P5897-108 lanterns.*

REINVENT EXTERIOR AREAS WITH  
SMOOTH CURVES HIGHLIGHTED  
BY CLEAR GLASS EXTERIOR  
SURROUNDING AN OPAL GLASS  
INTERIOR. ALUMINUM AND  
BRASS CONSTRUCTION.

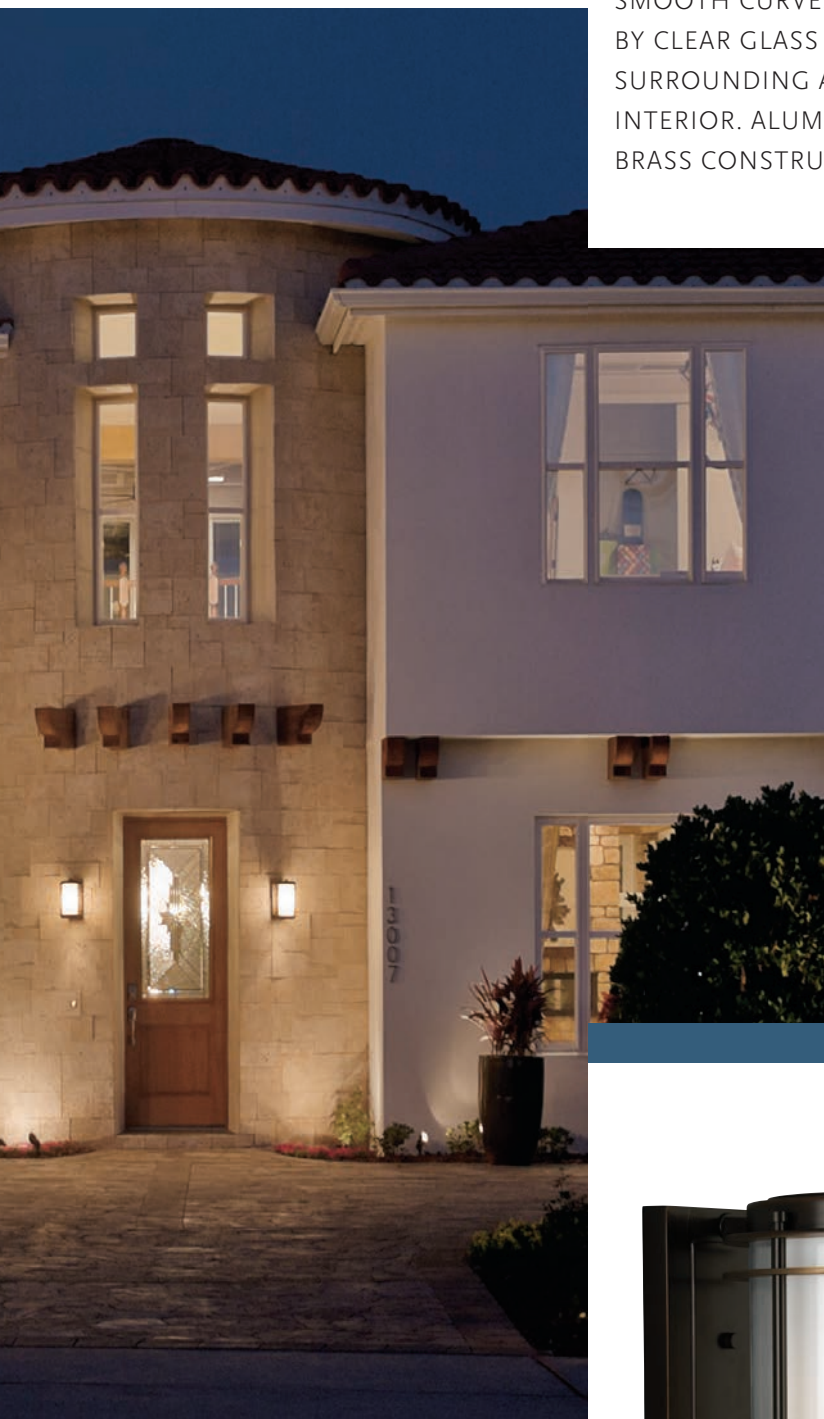

#### POST LANTERN

**P5472-108** Oil Rubbed Bronze  
Size: 8" dia., 14-3/4" ht.  
Fits 3" post (order separately).  
Lamp: One medium base  
lamp, 100w max.

#### MEDIUM WALL LANTERN

**P5896-108** Oil Rubbed Bronze  
Size: 8" W., 11-3/4" ht.  
Extends 10-1/4". H/CTR 6".  
Lamp: One medium base  
lamp, 100w max.

#### EXTRA LARGE WALL LANTERN

**P5899-108** Oil Rubbed Bronze  
Size: 8" W., 24" ht. Extends 10-3/8".  
H/CTR 12-1/4".  
Lamps: Two medium base  
lamps, each 75w max.



P5899-108



P5896-108



P5472-108

See page 298 for additional chain,  
and page 628 for posts.

# Regatta

UPDATED COASTAL STYLING MEETS CONTEMPORARY DESIGN. EXTERIOR CLEAR SEEDED GLASS WITH ETCHED OPAL GLASS INSIDE. POWDER COAT ANTIQUE BRONZE FINISH. ALUMINUM AND STEEL CONSTRUCTION.



## MEDIUM WALL LANTERN

**P5997-20** Antique Bronze  
Size: 7-1/2" W., 11" ht.  
Extends 7 3/4". H/CTR 6".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5998-20** Antique Bronze  
Size: 9-1/2" W., 13" ht.  
Extends 9-3/8". H/CTR 6-1/2".  
Lamp: One medium base lamp, 100w max.

## POST LANTERN

**P6405-20** Antique Bronze  
Size: 9-1/2" dia., 16-3/4" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6505-20** Antique Bronze  
Size: 9 1/2" dia., 15-1/2" ht.  
Overall ht w/chain 87"; wire 120".  
Lamp: One medium base lamp, 100w max.



P5997-20



P6405-20



# Scope

"X" MARKS THE SPOT WITH TRADITIONAL AND RUSTIC DETAILING THAT DEFINES THE SCOPE OF THIS OUTDOOR LANTERN COLLECTION. ETCHED OPAL GLASS AND ANTIQUE BRONZE FINISH ON EACH FIXTURE.

## SMALL WALL LANTERN

**P6047-20** Antique Bronze  
Size: 6-1/2" W., 8-7/8" ht.  
Extends 7-1/2". H/CTR 3-1/2".  
Lamp: One medium base lamp,  
100w max.



P6047-20

## MEDIUM WALL LANTERN

**P6048-20** Antique Bronze  
Size: 8-1/2" W., 12-1/4" ht.  
Extends 9-1/2". H/CTR 4-3/8".  
Lamp: One medium base lamp,  
100w max.



P6048-20

## LARGE WALL LANTERN

**P6049-20** Antique Bronze  
Size: 10-1/2" W., 15" ht. Extends  
11-1/2". H/CTR 4-3/8".  
Lamp: One medium base lamp,  
100w max.



P6049-20

## POST LANTERN

**P6434-20** Antique Bronze  
Size: 10-1/2" W., 18" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp,  
100w max.



P6434-20

## HANGING LANTERN

**P6534-20** Antique Bronze  
Size: 8-3/8" W., 13-3/4" ht.  
Overall ht. w/chain 87";  
wire 15'.  
Lamp: One medium base  
lamp, 100w max.



P6534-20

See page 298 for additional chain,  
and page 628 for posts.

# Greetings



## HANGING LANTERN

**P5549-20** Antique Bronze  
Size: 9-1/2" dia., 21-3/4" ht.  
Overall ht w/chain 96"; wire 10'.  
Lamp: One medium base lamp,  
100w max.

## SMALL WALL LANTERN

**P5631-20** Antique Bronze  
Size: 5-3/4" W., 12-1/2" ht.  
Extends 8". H/CTR 6-1/2".  
Lamp: One medium base  
lamp, 100w max.

## MEDIUM WALL LANTERN

**P5719-20** Antique Bronze  
Size: 7-1/2" W., 16-3/4" ht.  
Extends 10". H/CTR 9-1/8".  
Lamp: One medium base  
lamp, 100w max.





GREET GUESTS WITH AN ARCHITECTURAL INSPIRED FRAME. MODERN DRUM PROFILE AND ETCHED GLASS SHADES. POWDER COAT ANTIQUE BRONZE FINISH. ALUMINUM AND STEEL CONSTRUCTION.



P5449-20

#### POST LANTERN

**P5449-20** Antique Bronze  
Size: 9-1/2" dia., 23-3/4" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

#### LARGE WALL LANTERN

**P5728-20** Antique Bronze  
Size: 9 1/2" W., 20-3/4" ht.  
Extends 12-3/8". H/CTR 11-1/8".  
Lamp: One medium base lamp, 100w max.



P5728-20

See page 299 for additional chain,  
and page 628 for posts.

# DIBS

SQUARE ETCHED OPAL  
SHADES SUSPENDED IN A  
RECTILINEAR FRAMEWORK.  
STEEL CONSTRUCTION WITH  
ANTIQUED BRONZE POWDER  
COAT FINISH.



P5590-20

## POST LANTERN

**P5490-20** Antique Bronze  
Size: 9-3/4" L., 7-5/8" W.,  
15-1/2" ht. Fits 3" post (order  
separately).  
Lamp: One medium base lamp,  
100w max.

## MEDIUM WALL LANTERN

**P5991-20** Antique Bronze  
Size: 9-3/4" W., 16-1/2" ht.  
H/CTR 8-1/4". Extends 6-1/2".  
Lamp: One medium base  
lamp, 100w max.

## HANGING LANTERN

**P5590-20** Antique Bronze  
Size: 9-3/4" L., 7-5/8" W.,  
16-1/2" ht., Overall ht.  
w/chain 91"; wire 10'.  
Lamp: One medium base  
lamp, 100w max.



P5992-20



P5990-20

## SMALL WALL LANTERN

**P5990-20** Antique Bronze  
Size: 7-3/4" W., 14" ht.  
H/CTR 7". Extends 5-5/8".  
Lamp: One medium base  
lamp, 100w max.

## LARGE WALL LANTERN

**P5992-20** Antique Bronze  
Size: 11-3/4" W., 18" ht.  
H/CTR 9". Extends 7-1/4".  
Lamp: One medium base  
lamp, 100w max.



P5991-20



P5490-20

# JACK

RECTILINEAR DESIGN. ANTIQUE BRONZE FINISH WITH ETCHED UMBER FLAX GLASS. STEEL CONSTRUCTION.



P5948-20



P5949-20

**SMALL WALL LANTERN**  
**P5948-20** Antique Bronze  
 Size: 6" W., 13-5/8" ht.  
 Extends 6-1/4". H/CTR 5-1/4".  
 Lamps: One medium base,  
 100w max.

**MEDIUM WALL LANTERN**  
**P5949-20** Antique Bronze  
 Size: 8" W., 15-1/4" ht.  
 Extends 6-1/4". H/CTR 5-7/8".  
 Lamp: One medium base,  
 100w max.



P6603-20



P6602-20

# PEEK-A-BOO

ETCHED GLASS SHADE "PEEK THROUGH"  
 ARCHED FRAME. CLEAN, CONTEMPORARY WALL  
 LANTERNS IN STEEL CONSTRUCTION WITH  
 ANTIQUE BRONZE POWDER COAT FINISH.

**MEDIUM WALL LANTERN**  
**P6602-20** Antique Bronze  
 Size: 5-1/2" W., 13" ht.  
 Extends 3-1/4". H/CTR 7-1/4".  
 Lamp: One candelabra base  
 lamp, 60w max.

**LARGE WALL LANTERN**  
**P6603-20** Antique Bronze  
 Size: 5-1/2" W., 17-1/8" ht.  
 Extends 3-1/4". H/CTR 10-3/4".  
 Lamp: One medium base T10  
 lamp, 60w max.

See page 298 for additional chain,  
 and page 628 for posts.

# Bay Court



P5589-20

## POST LANTERN

**P5499-20** Antique Bronze

Size: 8-3/4" dia., 14-1/2" ht.

Fits 3" post (order separately).

Lamp: One medium base lamp, 100w max.



P5499-20

## HANGING LANTERN

**P5589-20** Antique Bronze

Size: 8-3/4" dia., 12-3/4" ht.

Overall ht w/chain 87"; wire 10'.

Lamp: One medium base lamp, 100w max.



P5849-20

## MEDIUM WALL LANTERN

**P5849-20** Antique Bronze

Size: 8-3/4" W., 10-1/4" ht.

Extends 10-3/8". H/CTR 5-1/4".

Lamp: One medium base lamp, 100w max.

REDISCOVER ANTIQUE NAUTICAL LANTERNS WITH ETCHED GLASS DIFFUSER SURROUNDED BY WATER GLASS GALLERY. ALUMINUM AND STEEL CONSTRUCTION. ANTIQUE BRONZE POWDER COAT FINISH.



P3942-20



P3941-20

**FLUSH MOUNT**

**P3941-20** Antique Bronze  
Size: 11-5/8" dia., 11" ht.  
Lamp: One medium base lamp, 100w max.

**FLUSH MOUNT**

**P3942-20** Antique Bronze  
Size: 15" dia., 7-3/8" ht.  
Lamps: Two medium base lamps, each 60w max.



P5851-20

**LARGE WALL LANTERN**

**P5851-20** Antique Bronze  
Size: 11-5/8" W., 13-5/8" ht.  
Extends 13-3/8". H/CTR 7".  
Lamp: One medium base lamp, 100w max.

*See page 299 for additional chain,  
and page 628 for posts.*



# Format

THE FORMAT COLLECTION IS COMPRISED OF AN OVAL FORM FACTOR WITH GRID OVERLAY. ETCHED GLASS SHADES. CAST ALUMINUM WITH A POWDER COAT FINISH.

## SMALL WALL LANTERN

**P6062-31** Black  
Size: 5-7/8" W., 3-7/8" L., 7-5/8" ht. Extends 4-7/8".  
H/CTR 2-3/4".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P6063-31** Black  
Size: 7-3/8" W., 4-7/8" L., 11-5/8" ht. Extends 6".  
H/CTR 3-1/2".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P6064-31** Black  
Size: 9-1/2" W., 6-1/2" L., 16-1/8" ht. Extends 7-1/2".  
H/CTR 4-5/8".  
Lamp: One medium base lamp, 100w max.

## POST LANTERN

**P6428-31** Black  
Size: 9-1/2" W., 6-1/4" L., 7-1/8" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6514-31** Black \*  
Size: 9-1/2" W., 6-1/4" L., 14-3/4" ht. Overall ht. w/chain 80-3/4"; wire 15'.  
Lamp: One medium base lamp, 100w max.

## SMALL HANGING LANTERN

**P6528-31** Black \*  
Size: 5-7/8" W., 3-7/8" L., 7-3/8" ht. Overall ht. w/chain 72-5/8"; wire 15'.  
Lamp: One medium base lamp, 100w max.



P6062-31



P6514-31



P6528-31



P6063-31



P6064-31



P6428-31

\* Includes one 6" stem, four 12" stems and 6 links of chain.

MODERN FORMS AND LAYERED GLASS. ETCHED OPAL GLASS WITHIN SEEDED GLASS SHADE. OFFERS DESIGN FLEXIBILITY FOR EXTERIOR SETTINGS AND IN UNEXPECTED INTERIOR APPLICATIONS. STEEL CONSTRUCTION WITH A POWDER COAT FINISH.

# COMPEL



## SMALL WALL LANTERN

**P6038-31** Black

Size: 5-3/4" W., 9-7/8" ht.  
Extends 7-1/4". H/CTR 5-1/4".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P6039-31** Black

Size: 7-7/8" W., 13-1/2" ht.  
Extends 9-3/8". H/CTR 7-1/2".  
Lamp: One medium base lamp, 100w max.

## POST LANTERN

**P6420-31** Black

Size: 7-7/8" W., 21-5/8" ht.  
Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.



P6039-31



P6420-31

## HANGING LANTERN

**P6520-31** Black

Size: 7-7/8" dia., 15-3/8" ht.  
Overall ht. w/chain 90";  
wire 15'.  
Lamp: One medium base lamp, 100w max.

See page 299 for additional chain,  
and page 628 for posts.

# WELBOURNE



## POST LANTERN

**P5482-20** Antique Bronze

**P5482-30** Textured White

**P5482-31** Textured Black

Size: 9-1/2" dia., 21-1/4" ht.

Fits 3" post (order separately).

Lamps: One medium base lamp, 100w max.

## WALL LANTERN

**P5681-20** Antique Bronze

**P5681-30** Textured White

**P5681-31** Textured Black

Size: 6-1/2" W., 16-7/8" ht.

Extends 9-1/4". H/CTR 13-1/4".

Lamp: One medium base lamp, 100w max.

## SMALL WALL LANTERN

**P5682-20** Antique Bronze

**P5682-30** Textured White

**P5682-31** Textured Black

Size: 6-1/2" W., 13-1/4" ht.

Extends 9". H/CTR 3-1/2".

Lamp: One medium base lamp, 100w max.



P5682-30



P5682-31



P5682-20



P5482-31



P5482-20



P5681-20



P5681-30

HEXAGONAL CAST ALUMINUM FRAMEWORK WITH VINE-INSPIRED SCROLLS. BEVELED CLEAR GLASS PANELS IN TEXTURED BLACK OR TEXTURED WHITE FINISHES. FLAT ETCHED GLASS IN ANTIQUE BRONZE FINISH. CAST ALUMINUM CONSTRUCTION.

#### LARGE POST LANTERN

**P5483-20** Antique Bronze

**P5483-30** Textured White

**P5483-31** Textured Black

Size: 13" dia., 26" ht.

Fits 3" post (order separately).

Lamps: Three candelabra base lamps, 60w max.

#### HANGING LANTERN

**P5582-20** Antique Bronze

**P5582-30** Textured White

**P5582-31** Textured Black

Size: 9-1/2" dia., 15" ht.,

Overall ht. w/ chain 51"; wire 10'

Lamp: One medium base lamp, 100w max.

#### MEDIUM WALL LANTERN

**P5683-20** Antique Bronze

**P5683-30** Textured White

**P5683-31** Textured Black

Size: 9-1/2" W., 18" ht.

Extends 9-3/4" H/CTR 8-1/2".

Lamp: One medium base lamp, 100w max.



P5582-31



P5582-30



P5683-31



P5683-20



P5681-31



P5483-31



P5483-20

See page 298 for additional chain, and page 628 for posts.



HEXAGONAL CAST ALUMINUM FRAMEWORK WITH VINE-INSPIRED SCROLLS. BEVELED CLEAR GLASS PANELS IN TEXTURED BLACK FINISH. FLAT ETCHED GLASS IN ANTIQUE BRONZE FINISH.

# WELBOURNE

## MEDIUM WALL LANTERN

**P5684-20** Antique Bronze

**P5684-31** Textured Black

Use with or without tail.

Size: 9-1/2" W., 30-3/4" ht.

with tail. 23-1/4" ht. without tail.

Extends 11-3/8". H/CTR 18-3/8"

Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P5690-20** Antique Bronze

**P5690-31** Textured Black

Size: 13" W., 22-1/4" ht.

Extends 14". H/CTR 5".

Lamps: Three candelabra base lamps, each 60w max.



P5684-20



P5684-31  
shown with tail

## LARGE POST LANTERN

**P5486-31** Textured Black

120V NPF magnetic ballast.

White glass chimney.

Size: 13" dia., 26" ht. Fits 3"

post (order separately).

Lamp: One 100w high pressure sodium E17.

## LARGE POST LANTERN

**P5485-31EB** Textured Black

One-light post lantern. White

glass chimney. 120V/277V

HPF electronic ballast.

Size: 13" dia., 26" ht. Fits 3"

post (order separately).

Lamp: One 26w, 32w,

42w 4-pin quad CFL.



P5690-20



P5690-31



P5486-31  
P5485-31EB





*Fairview*

EXPLORE THE GREAT OUTDOORS WITH CLASSIC DETAILS. SOFTLY ETCHED GLASS AND A POWDER COAT TEXTURED FINISH ON ALUMINUM FRAME.



#### POST LANTERN

**P5402-31** Textured Black  
Size: 10-1/2" dia., 18-1/4" ht.  
Fits 3" post (order separately). Lamp: One medium base lamp, 100w max.

#### SMALL WALL LANTERN

**P5775-31** Textured Black  
Size: 6-1/2" W., 11-3/4" ht.  
Extends 8-1/2". H/CTR 3-3/4".  
Lamp: One medium base lamp, 75w max.

#### MEDIUM WALL LANTERN

**P5778-31** Textured Black  
Size: 8-3/8" W., 14-1/2" ht.  
Extends 11-1/4". H/CTR 10".  
Lamp: One medium base lamp, 100w max.

#### LARGE WALL LANTERN

**P5780-31** Textured Black  
Size: 10-1/2" W., 17" ht.  
Extends 12-1/4". H/CTR 12-1/2".  
Lamp: One medium base lamp, 100w max.

#### HANGING LANTERN

**P5848-31** Textured Black  
Size: 10-1/2" dia., 17-1/4" ht.  
Overall ht. w/chain 92"; wire 15'.  
Lamp: One medium base lamp, 100w max.

For CFL versions see pages 599.

See page 298 for additional chain, and page 628 for posts.

# ONION LANTERNS



P5700-31



P5878-31



P5701-31



MEDIUM WALL LANTERN

**P5700-31** Black  
Size: 7-3/4" W., 23-1/4" ht.  
Extends 10-3/4".  
Lamps: Three candelabra base  
lamps, each 60w max.

LARGE WALL LANTERN

**P5701-31** Black  
Four-light wall lantern.  
Size: 11-1/8" W., 31" ht.  
Extends 16".  
Lamps: Four candelabra  
base lamps, each 60w max.

SMALL WALL LANTERN

**P5878-31** Black  
Size: 6-1/2" W., 21-1/4" ht.  
Extends 10". H/CTR 13-1/8".  
Lamp: One medium base  
lamp, 100w max.



DETAILED FINIALS, END CAPS AND SCROLLWORK IN POWDER COAT BLACK FINISH, FEATURING CLEAR BEVELED GLASS AND CAST ALUMINUM FRAMES.



**POST LANTERN**

**P5401-31** Black  
Size: 11-1/8" dia., 27-3/4" ht.  
Fits 3" post (order separately).  
Lamps: Four candelabra base  
lamps, each 60w max.

**HANGING LANTERN**

**P5501-31** Black  
Size: 11-1/8" dia., 28" ht.  
Overall ht. w/chain 102";  
wire 15'.  
Lamps: Four candelabra  
base lamps, each 60w max.



P5501-31

*Shown: P5401-31 lanterns.*



P5401-31

*See page 298 for additional chain,  
and page 628 for posts.*

# Edition

EDITION FEATURES CLEAR WATER GLASS ELEMENTS AND A DIE-CAST ALUMINUM, POWDER COATED FRAME. THE DISTINCT HEXAGONAL SHAPE OFFERS A CLASSICAL STYLE TO CONSIDER FOR UPDATING A HOME'S CURB APPEAL.



## SMALL WALL LANTERN

**P6070-31** Black  
Size: 5-1/2" W., 9-1/8" ht.  
Extends 6-1/2". H/CTR 2-3/4".  
Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P6071-31** Black  
Size: 7-1/8" W., 12-1/2" ht.  
Extends 8-1/8". H/CTR 3-1/8".  
Lamp: One medium base lamp, 100w max.

## LARGE WALL LANTERN

**P6072-31** Black  
Size: 9" W., 15-7/8" ht.  
Extends 10". H/CTR 4-1/16".  
Lamp: One medium base lamp, 100w max.



## POST LANTERN

**P6429-31** Black  
Size: 9" W., 21-7/8" ht. Fits 3" post (order separately).  
Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P6529-31** Textured Black  
Size: 7-1/8" dia., 13" ht.  
Overall ht. w/chain 88"; wire 180".  
Lamp: One medium base lamp, 100w max.



WHITE LINEN GLASS IS COMPLETED WITH A POWDER COATED ALUMINUM FRAME AND BLACK FINISH, WHILE AN UMBER LINEN GLASS SHADE COMPLEMENTS THE WARM ANTIQUE BRONZE FINISH.

# Essential



P6059-31



## SMALL WALL LANTERN

**P6059-20** Antique Bronze

**P6059-31** Black

Size: 5-7/8" W., 8-3/4" ht.

Extends 6-3/4". H/CTR 2-1/4".

Lamp: One medium base lamp, 100w max.

## MEDIUM WALL LANTERN

**P6060-20** Antique Bronze

**P6060-31** Black

Size: 8" W., 11-1/8" ht.

Extends 8-7/8". H/CTR 2-1/4".

Lamp: One medium base lamp, 100w max.

P6060-31



P6060-20



P6059-20



See page 299 for additional chain,  
and page 628 for posts.



# Westport



P5530-31

P5530-20

## LARGE POST LANTERN

**P5434-20** Antique Bronze

**P5434-30** White

**P5434-31** Black

Size: 11" dia., 19" ht.

Fits 3" post (order separately).

Lamps: Two candelabra base lamps, each 60w max.

## MEDIUM POST LANTERN

**P5445-20** Antique Bronze

**P5445-30** White

**P5445-31** Black

Size: 9" dia., 16-3/8" ht.

Fits 3" post (order separately).

Lamp: One medium base lamp, 100w max.

## HANGING LANTERN

**P5530-20** Antique Bronze

**P5530-30** White

**P5530-31** Black

Size: 9" dia., 14-5/8" ht.

Overall ht. w/chain 90", wire 15'.

Lamp: One medium base lamp, 100w max.



P5434-20



P5434-30



P5445-31



P5445-30

CLASSIC STYLING WITH DETAILED TOUCHES. CLEAR SEEDED GLASS WITH DIE-CAST ALUMINUM FRAMES AND DURABLE POWDER COAT FINISH.



P3883-30



P3883-31



P5862-20



P5862-31



P5862-30

#### FLUSH MOUNT

**P3883-20** Antique Bronze

**P3883-30** White

**P3883-31** Black

Size: 9" dia., 10-1/4" ht.

Lamp: One medium base lamp, 100w max.



P5863-31



P5864-30



P5863-20



P5864-31

#### SMALL WALL LANTERN

**P5862-20** Antique Bronze

**P5862-30** White

**P5862-31** Black

Size: 6-7/8" W., 12-3/4" ht.

Extends 8-3/8". H/CTR 3-1/4".

Lamp: One medium base lamp, 60w max.

#### MEDIUM WALL LANTERN

**P5863-20** Antique Bronze

**P5863-30** White

**P5863-31** Black

Size: 9" W., 15-7/8" ht.

Extends 10-3/8". H/CTR 3-1/4".

Lamp: One medium base lamp, 100w max.

#### LARGE WALL LANTERN

**P5864-20** Antique Bronze

**P5864-30** White

**P5864-31** Black

Size: 11" W., 19-1/4" ht;

Extends 12-7/8". H/CTR 4-5/8".

Lamps: Two candelabra base lamps, each 60w max.

For LED versions see pages 526-527.  
For fluorescent versions see pages 596-597.

See page 298 for additional chain,  
and page 628 for posts.

# Roman Coach



Product No.	Finish	Description	Size	Lamp(s)
<b>P5475-20</b>	Antique Bronze	One-light post lantern	7" W., 15-3/4" ht. Fits 3" post (order separately).	1 medium base, 100w max.
<b>P5565-20</b> <b>P5565-31</b>	Antique Bronze Black	One-light lantern. Chain and ceiling mounts included.	7" dia., 13" ht. Overall ht. w/chain 36"; wire 10'. Ceiling mount ht. 12-3/4".	1 medium base, 100w max.
<b>P5773-20</b>	Antique Bronze	One-light wall lantern. Can be used with or without tail	5-3/4" W., 18-1/4" ht. w/tail. 13-1/2" ht. w/o tail. Extends 5-3/4". H/CTR 7-1/4".	1 medium base, 100w max.
<b>P5777-20</b>	Antique Bronze	One-light wall lantern	7" W., 12-1/2" ht. Extends 7-1/4". H/CTR 4".	1 medium base, 100w max.
<b>P6019-20</b> <b>P6019-31</b>	Antique Bronze Black	Two-light flush mount	11" W., 6-3/8" ht.	2 medium base lamps, each 60w max.



ENJOY OUTDOOR SETTINGS WITH CLEAR SEEDED GLASS PANELS IN A SOLID BRASS AND ALUMINUM CONSTRUCTION.



Product No.	Finish	Description	Size	Lamp(s)
<b>P5762-20</b> <b>P5762-31</b>	Antique Bronze Black	One-light wall lantern	6" W., 9-3/4" ht. Extends 6-1/2". H/CTR 3-1/2".	1 medium base, 100w max.
<b>P5765-20</b> <b>P5765-31</b>	Antique Bronze Black	One-light wall lantern	7" W., 15-1/4" ht. Extends 7-1/4". H/CTR 6-7/8".	1 medium base, 100w max.
<b>P5767-20</b> <b>P5767-31</b>	Antique Bronze Black	One-light wall lantern. Can be used with or without tail.	7" W., 26-3/8" ht. w/tail. 19-1/4" ht. w/o tail. Extends 7". H/CTR 16-1/4".	1 medium base, 100w max.
<b>P6417-20</b> <b>P6417-31</b>	Antique Bronze Black	One-light post lantern	9-1/2" W., 22-1/2" ht. Fits 3" post (order separately).	1 medium base, 100w max.

See page 298 for additional chain,  
and page 628 for posts.

# Brassguard® Lanterns



## LARGE WALL LANTERNS

Product No.	Finish	Description	Size	Lamp(s)
P5432-10	Polished Solid Brass	Three-light post lantern	9-1/2" dia., 21" ht.	3 candelabra base, each 60w max.
P5432-31	Black		Fits 3" post (order separately).	
P5730-10	Polished Solid Brass	Three-light wall lantern	9-1/2" W., 26" ht. Extends 9-1/2". H/CTR 20-1/4".	3 candelabra base, each 60w max.
P5731-31	Black	Three-light wall lantern	9-1/2" W., 35" ht. Extends 9-1/2". H/CTR 20-1/2".	3 candelabra base, each 60w max.





UNIQUE, CLEAR LACQUER APPLIED FOR LONG-LASTING FINISH. NON-CORROSIVE ALL-BRASS CONSTRUCTION ELIMINATES RUST LEAKAGE ON BRASS FINISHES. INCLUDES PROTECTIVE GASKET. BLACK FINISH IS ALUMINUM CONSTRUCTION.



P5430-10



P5831-31



P5756-31



P5756-09

P5834-10  
chain mountP5834-10  
ceiling mount

P5832-10

### MEDIUM WALL LANTERNS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5430-10</b>	Polished Solid Brass	One-light post Fits 3" post (order separately).	7" dia., 17" ht.	1 medium base, 100w max.
<b>P5831-31</b>	Black	One-light wall lantern	7" W., 29" ht. Extends 6-3/4". H/CTR 15-3/8".	1 medium base, 100w max.
<b>P5832-10</b>	Polished Solid Brass	One-light wall lantern	7" W., 14-1/4" ht. Extends 7". H/CTR 5-3/8".	1 medium base, 100w max.
<b>P5834-10</b>	Polished Solid Brass	One-light hanging lantern. Chain and ceiling mounts both included.	7" dia., 10" ht. Overall ht. w/chain 39-1/2"; wire 10'.	1 medium base, 100w max.

### SMALL WALL LANTERNS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5756-09</b>	Brushed Nickel	One-light wall lantern. Open bottom.	5-1/2" W., 10-1/4" ht. Extends 5-3/4". H/CTR 3-3/4".	1 medium base, 100w max.
<b>P5756-31</b>	Black			
<b>P5758-31</b>	Black	One-light wall lantern	5-1/2" W., 18-3/4" ht. Extends 5-5/8". H/CTR 7-1/4".	1 medium base, 100w max.
<b>P5846-31</b>	Black	One-light wall lantern	5-1/4" W., 14-3/4" ht. Extends 6". H/CTR 8-3/8".	1 medium base, 60w max.



P5756-10

See page 298 for additional chain, and page 628 for posts.

## Cast Lantern

CAST ALUMINUM WITH  
SHATTER RESISTANT CLEAR  
ACRYLIC DIFFUSER.



P5826-30

P5826-31

### WALL LANTERN

**P5826-30** White

**P5826-31** Black

Size: 7" W., 15" ht.

Extends 9-3/4". H/CTR 10".

Lamp: One medium base  
lamp, 75w max.

## Motion Lantern

INTEGRAL MOTION SENSOR AUTOMATICALLY TURNS  
FIXTURE ON WHEN GUESTS APPROACH. ADJUSTABLE  
TIMER AND SENSITIVITY SETTINGS ON BACK PLATE.



P5662-31

### WALL LANTERN

**P5662-31** Black

Clear seeded glass.

Size: 9-1/2" W., 13" ht.

Extends 6-1/2". H/CTR 6".

Lamp: One medium base  
lamp, 100w max.

## Coach Lanterns

SQUARE FIXTURE WITH CLEAR  
FLAT GLASS.



P5607-09



P5607-20



P5607-10



P5607-31

### WALL LANTERN

**P5607-09** Brushed Nickel

**P5607-10** Polished Brass

**P5607-20** Antique Bronze

**P5607-31** Black

Size: 4-1/2" W., 8" ht.

Extends 6". H/CTR 2-3/4".

Lamp: One medium base  
lamp, 100w max.

## Night-Saver® Shield

SHIELD FITS OVER A-19 MEDIUM  
BASE BULB TO PROVIDE DARK SKY  
FRIENDLY ILLUMINATION.



P8709-20



P8709-31

**P8709-20** Antique Bronze

**P8709-31** Black

NightSaver® lamp shade.

Size: 3" W. bottom, 2-1/2" W. top.

# Pedigree

## POST LANTERN

**P6403-97** Autumn Haze

Size: 9" dia., 16-3/8" ht. Fits 3" post (order separately).

Lamp: One GU24 base CFL lamp, 26w max.



## HANGING LANTERN

**P6503-97** Autumn Haze

Size: 9" dia., 13-5/8" ht.

Overall ht w/chain 88";

wire 15'.

Lamp: One GU24 base CFL lamp, 26w max.



## EXTRA LARGE WALL LANTERN

**P6607-97** Autumn Haze

Size: 13-1/2" W., 19-3/8" ht.

Extends 15-3/4". H/CTR 6-3/4".

Lamp: One GU24 base CFL lamp, 42w max.



P6607-97



P6503-97



P6403-97

DURABLE POWDER COAT FINISH. CAST PYRAMIDAL BLOCK AND FLUTED UPRIGHTS. ENERGY EFFICIENT OUTDOOR LANTERNS WITH ETCHED SEEDED GLASS. CAST ALUMINUM CONSTRUCTION.



P5980-97

#### SMALL WALL LANTERN

**P5980-97** Autumn Haze

Size: 7" W., 10" ht. Extends 8-1/2". H/CTR 2-3/4".

Lamp: One GU24 base CFL lamp, 26w max.



#### MEDIUM WALL LANTERN

**P5981-97** Autumn Haze

Size: 9" W., 13-3/8" ht. Extends 10-1/2". H/CTR 5-3/4".

Lamp: One GU24 base CFL lamp, 26w max.



#### LARGE WALL LANTERN

**P5982-97** Autumn Haze

Size: 11-1/2" W., 16-1/2" ht. Extends 13-1/2". H/CTR 5-3/4".

Lamp: One GU24 base lamp, 26w max.



P5981-97



P5982-97

See page 298 for additional chain, and page 628 for posts.



# Promenade

PROMENADE FEATURES AN ETCHED OPAL SHADE SET WITHIN A CAST ALUMINUM FRAME WITH A DURABLE BLACK POWDER COAT FINISH.



## SMALL WALL LANTERN

**P6033-31WB** Black

Size: 6-1/2" W., 10-3/4" ht.  
Extends 7-3/4". H/CTR 3-5/8".  
Lamp: One GU24 base CFL  
lamp, 13w max. included.



## MEDIUM WALL LANTERN

**P6034-31WB** Black

Size: 8-1/2" W., 13-3/4" ht.  
Extends 9-3/4". H/CTR 3-5/8".  
Lamp: One GU24 base CFL lamp,  
26w max. included.



## LARGE WALL LANTERN

**P6035-31WB** Black

Size: 10-1/2" W., 16-7/8" ht.  
Extends 12". H/CTR 4-1/2".  
Lamp: One GU24 base CFL  
lamp, 26w max. included.



## POST LANTERN

**P6418-31WB** Black

Size: 10-1/2" W.,  
19-3/4" ht. Fits 3" post  
(order separately).  
Lamp: One GU24 base CFL  
lamp, 26w max. included.



## HANGING LANTERN

**P6518-31WB** Black

Size: 8-1/2" W., 14-3/8" ht.  
Extends 8-1/2". Overall ht.  
w/chain 89-3/8"; wire 10'  
Lamp: One GU24 base CFL  
lamp, 26w max. included.



P6035-31WB

P6418-31WB

See page 298 for additional chain,  
and page 628 for posts.

VIA IS A STRIKINGLY MODERN ENERGY EFFICIENT OUTDOOR LANTERN WITH NAUTICAL OVERTONES. A POWDER COAT TEXTURED BLACK FINISH IS PAIRED WITH ETCHED OPAL GLASS.

# VIA

## SMALL WALL LANTERN

**P6010-31** Textured Black  
Size: 7" W., 10-3/4" ht.  
Extends 7-3/4". H/CTR  
7-3/4".  
Lamp: One GU24 base CFL  
lamp, 18w max.



## MEDIUM WALL LANTERN

**P6011-31** Textured Black  
Size: 9-3/4" W., 14" ht. Extends  
10-1/2". H/CTR 10-7/8".  
Lamp: One GU24 base CFL  
lamp, 26w max.



## LARGE WALL LANTERN

**P6012-31** Textured Black  
Size: 12" W., 17" ht. Extends  
12-7/8". H/CTR 10-1/2".  
Lamp: One GU24 base CFL  
lamp, 42w max.



## POST LANTERN

**P6409-31** Textured Black  
Size: 12" W., 17-3/4" ht. Fits  
3" post (order separately).  
Lamp: One GU24 base CFL  
lamp, 42w max.



## HANGING LANTERN

**P6509-31** Textured Black  
Size: 9-7/8" W., 13-3/8" ht.  
Overall ht. w/chain 86-1/2";  
wire 15'  
Lamp: One GU24 base CFL  
lamp, 26w max.



P6010-31



P6011-31



P6509-31




P6012-31



P6409-31

# Loyal

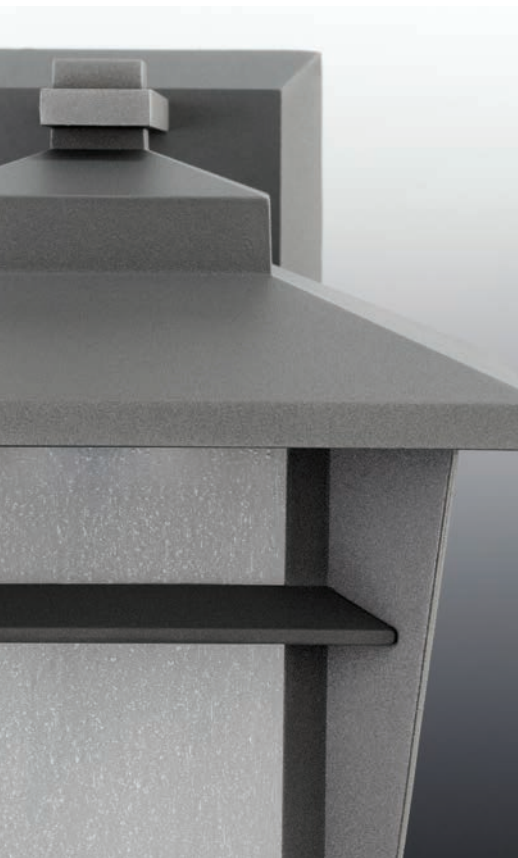

P6521-20WB



P6521-136WB



P6421-136WB



P6421-20WB

## HANGING LANTERN

**P6521-20WB** Antique Bronze

**P6521-136WB** Textured Graphite

Size: 9" W., 14" ht. Overall ht.

w/chain 89"; wire 15'

Lamp: One GU24 base CFL lamp,  
26w max. included.



## POST LANTERN

**P6421-20WB** Antique Bronze

**P6421-136WB** Textured Graphite

Size: 11" W., 17-7/8" ht. Fits 3"

post (order separately).

Lamp: One GU24 base CFL lamp,  
26w max. included.



LOYAL OFFERS MODERN STYLING THAT COMPLEMENTS A VARIETY OF ARCHITECTURAL STYLES. CLEAR SEEDED GLASS WITH INSIDE ETCHED DETAILING ADDS INTRIGUE TO THE POWDERCOAT FINISH OVER A CAST ALUMINUM FRAME.



P6040-20WB



P6041-136WB



P6041-136WB



P6041-20WB



P6042-136WB



P6042-20WB

#### SMALL WALL LANTERN

**P6040-20WB** Antique Bronze

**P6040-136WB** Textured Graphite

Size: 7" W., 10-1/4" ht.

Extends 7-1/8". H/CTR 2-1/2".

Lamp: One GU24 base CFL lamp, 18w max. included.



#### MEDIUM WALL LANTERN

**P6041-20WB** Antique Bronze

**P6041-136WB** Textured Graphite

Size: 9" W., 12-7/8" ht.

Extends 9". H/CTR 2-5/8".

Lamp: One GU24 base CFL lamp, 26w max. included.



#### LARGE WALL LANTERN

**P6042-20WB** Antique Bronze

**P6042-136WB** Textured Graphite

Size: 11" W., 15-3/4" ht.

Extends 10-3/4". H/CTR 2-5/8".

Lamp: One GU24 base CFL lamp, 26w max. included.



See page 299 for additional chain,  
and page 628 for posts.

# Crawford CFL

## MEDIUM WALL LANTERN

**P5686-31** Black

**P5686-108** Oil Rubbed Bronze

Size: 8-1/2" W., 16-3/4" ht.

Extends 11-1/8" H/CTR 9-5/8".

Lamp: One GU24 CFL lamp,  
26w max.



## POST LANTERN

**P6419-31** Black

Size: 12" W., 28-1/2" ht.

Fits 3" post (order separately).

Lamp: One GU24 CFL lamp,  
32w max.



## LARGE WALL LANTERN

**P6614-31** Black

Size: 12" W., 32-3/4" ht.

Extends 14-3/4" H/CTR  
14-3/4".

Lamp: One GU24 CFL lamp,  
32w max.



P5686-108



P5686-31



P6419-31



P6614-31

For incandescent versions see  
pages 536-537.



TRANSFORM THE OUTDOORS WITH  
TIMELESS STYLING. CAST ALUMINUM  
WITH ETCHED FLAT GLASS. ENERGY  
EFFICIENT. POWDER COAT FINISH.

P6519-31



## SMALL WALL LANTERN

**P5685-31** Black**P5685-108** Oil Rubbed Bronze

Size: 6-1/2" W., 12-1/2" ht.

Extends 8-3/4". H/CTR 8".

Lamp: One GU24 CFL lamp,  
13w max.

## HANGING LANTERN

**P6519-31** Black

Size: 12" dia., 29-3/8" ht.

Overall ht. w/ chain 68"; wire 15'.

Lamp: One GU24 CFL lamp,  
32w max.

## MEDIUM WALL LANTERN

**P6613-31** Black

Size: 10" W., 29" ht.

Extends 12-1/2". H/CTR 11-5/8".

Lamp: One GU24 CFL lamp,  
26w max

P6613-31



P5685-31



P5685-108



See page 299 for additional chain,  
and page 628 for posts.

# Ashmore CFL

RENEW YOUR SETTING WITH HANDSOME DETAILS, QUILL-SCROLLED ARMS AND DECORATIVE FINIALS. TEXTURED BLACK OR ANTIQUE BRONZE FINISH. DIE-CAST ALUMINUM CONSTRUCTION.



P5874-20WB



P5874-31WB



P5875-20WB



P5875-31WB



P5876-31WB



P5876-20WB

## SMALL WALL LANTERN

**P5874-20WB** Antique Bronze

**P5874-31WB** Textured Black

Etched glass.

Size: 6-3/8" W., 14-3/8" ht.

Extends 9-1/2". H/CTR 4-1/2".

Lamp: One GU24 CFL lamp, 26w max.



## LARGE WALL LANTERN

**P5876-20WB** Antique Bronze

**P5876-31WB** Black

Size: 9-5/8" W., 20-1/2" ht.

Extends 12-3/4". H/CTR 7".

Lamp: One GU24 base CFL lamp, 26w max.



## MEDIUM WALL LANTERN

**P5875-20WB** Antique Bronze

**P5875-31WB** Textured Black

Etched glass.

Size: 8-3/8" W., 16-5/8" ht.

Extends 10-1/2". H/CTR 4-1/2".

Lamp: One GU24 CFL lamp, 26w max.



For incandescent versions see pages 512-543.

# Fairview CFL

ENERGY EFFICIENT CAST ALUMINUM  
LANTERNS. ETCHED GLASS AND  
TEXTURED BLACK POWDERCOAT FINISH.



P5492-31



P5547-31



P5494-31



P5496-31



P5489-31

## POST LANTERN

**P5489-31** Textured Black  
Size: 10-1/2" W., 18-1/4" ht.  
Fits 3" post (order separately).  
Lamp: One GU24 CFL lamp,  
26w max.



## SMALL WALL LANTERN

**P5492-31** Textured Black  
Size: 6-1/2" W., 11-3/4" ht.  
Extends 8-1/2". H/CTR  
3-3/4".  
Lamp: One GU24 CFL lamp,  
13w max.



## MEDIUM WALL LANTERN

**P5494-31** Textured Black  
Size: 8-3/8" W., 14-1/2" ht.  
Extends 11-1/4". H/CTR 10".  
Lamp: One GU24 CFL lamp,  
18w max.



## LARGE WALL LANTERN

**P5496-31** Textured Black  
Size: 10-1/2" W., 17" ht.  
Extends 12-1/4". H/CTR 12-1/2".  
Lamp: One GU24 CFL lamp,  
26w max.



## ONE-LIGHT HANGING LANTERN

**P5547-31** Textured Black  
Size: 10-1/2" W., 17-1/4" ht.  
Overall ht. w/chain 92",  
wire 15'.  
Lamp: One GU24 CFL lamp,  
26w max.



For incandescent versions see  
page 577.

See page 298 for additional chain,  
and page 628 for posts.

# WELBOURNE CFL



## MEDIUM WALL LANTERN

**P5683-20EB** Antique Bronze

**P5683-31EB** Textured Black

Size: 9-1/2" W., 18" ht.

Extends 9-3/4" H/CTR 8-1/2".

Lamp: One GU24 CFL lamp,  
18w max.



P5684-31EB



P5683-20EB

## LARGE WALL LANTERN

**P5684-20EB** Antique Bronze

**P5684-31EB** Textured Black

Use with or without tail.

Size: 9-1/2" W., 31-1/4" ht.

with tail. 23-1/4" ht. without tail.

Extends 10-1/2". H/CTR 19"

Lamp: One GU24 CFL lamp,  
26w max.



P5683-31EB



HEXAGONAL FRAMEWORK WITH VINE INSPIRED SCROLLS. ETCHED FLAT GLASS PANELS. ENERGY EFFICIENT. CAST ALUMINUM CONSTRUCTION WITH POWDER COAT FINISH.

#### POST LANTERN

**P5482-20EB** Antique Bronze

**P5482-31EB** Textured Black

Size: 9-1/2" dia., 21-1/4" ht.

Fits 3" post (order separately).

Lamp: One GU24 CFL lamp, 18w max.



#### HANGING LANTERN

**P5582-20EB** Antique Bronze

**P5582-31EB** Textured Black

Size: 9-1/2" dia., 15" ht.,

Overall ht. w/ chain 51"; wire 10'.

Lamp: One GU24 CFL lamp, 18w max.



P5682-31EB

#### SMALL WALL LANTERN

**P5682-20EB** Antique Bronze

**P5682-31EB** Textured Black

Size: 6-1/2" W., 13-1/4" ht.

Extends 9". H/CTR 3-1/2".

Lamp: One GU24 CFL lamp, 26w max.



P5682-20EB



P5582-20EB



P5582-31EB



P5482-20EB



P5482-31EB

See page 299 for additional chain,  
and page 628 for posts.



# Westport CFL

## FLUSH MOUNT

**P3883-20WB** Antique Bronze

**P3883-31WB** Black

Size: 9" dia., 10-1/2" ht.

Lamp: One 13w GU24 CFL lamp, (included).



## SMALL WALL LANTERN

**P5862-20WB** Antique Bronze

**P5862-31WB** Black

Size: 6-7/8" W., 12-3/4" ht.

Extends 8-3/8". H/CTR 3-1/4".

Lamp: One 13w GU24 CFL lamp, (included).



## LARGE WALL LANTERN

**P5864-20WB** Antique Bronze

**P5864-31WB** Black

Size: 11" W., 19-1/4" ht.

Extends 12-7/8". H/CTR 4-5/8".

Lamp: One 18w GU24 CFL lamp, (included).



P3883-20WB

P3883-31WB



P5862-20WB



P5862-31WB



P5864-20WB



P5864-31WB

For LED versions see pages 532-533.  
For incandescent versions see pages 582-583.

ADD A TOUCH OF RUSTIC APPEAL WITH BEADED DETAILING. ETCHED SEEDED GLASS WITH DIE-CAST ALUMINUM FRAMES WITH DURABLE POWDER COAT FINISH.



P5863-20WB



P5863-31WB



P5434-31EB



P5434-20EB

#### POST LANTERN

**P5434-20EB** Antique Bronze

**P5434-31EB** Black

Size: 11" dia., 19" ht. Fits 3" post (order separately).

Lamp: One 18w GU24 CFL lamp, (included).



#### MEDIUM WALL LANTERN

**P5863-20WB** Antique Bronze

**P5863-31WB** Black

Size: 9" W., 16" ht.

Extends 10-3/8". H/CTR 3-1/2".

Lamp: One 13w GU24 CFL lamp, (included).



See page 298 for additional chain,  
and page 628 for posts.

# PARKER

WHITE ACRYLIC DIFFUSER CAN BE USED  
INDOORS AND OUTDOORS. REMOVE TOP  
AND BOTTOM END CAPS FOR INDOOR USE.  
DIE-CAST ALUMINUM CONSTRUCTION WITH  
POWDER COAT FINISH.

## MEDIUM WALL LANTERN

**P5914-16** Satin Aluminum

**P5914-20** Antique Bronze

White acrylic diffuser.

Size: 5-3/8" W., 10-1/4" ht.

Extends 4".

Lamp: One GU24 CFL lamp, 26w  
max.

ADA



## LARGE WALL LANTERN

**P5915-16** Satin Aluminum

**P5915-20** Antique Bronze

White acrylic diffuser.

Size: 5-3/8" W., 16-7/8" ht.

Extends 4".

Lamps: Two GU24 CFL lamps,  
each 26w max.

ADA



P5914-16



P5914-20



P5915-16



P5915-20



## VALERA

TRANSFORM OUTDOOR SETTINGS WITH A BOLD, STRAIGHTFORWARD STYLE. DOUBLE LINEAR DETAILS FINISHED IN BRUSHED NICKEL OR ANTIQUE BRONZE OVER A WHITE ACRYLIC DIFFUSER. DIE-CAST ALUMINUM CONSTRUCTION.



Shown: P5800-20.

## SMALL WALL LANTERN

**P5800-09** Brushed Nickel

**P5800-20** Antique Bronze

Size: 5-1/4" W., 8" ht.

Extends 4".

Lamp: One GU24 CFL lamp,  
18w max.

ADA



## MEDIUM WALL LANTERN

**P5801-09** Brushed Nickel

**P5801-20** Antique Bronze

Size: 8-3/8" W., 11-1/8" ht.

Extends 4".

Lamp: One GU24 CFL lamp,  
26w max.

ADA



## LARGE WALL LANTERN

**P5806-09** Brushed Nickel

**P5806-20** Antique Bronze

Size: 5-5/8" W., 16-1/8" ht.

Extends 4".

Lamps: Two GU24 CFL lamps,  
each 18w max.

ADA



P5800-20



P5800-09



P5801-09



P5801-20



P5806-20



P5806-09

## ANSON



P5736-09



P5736-129

ENJOY A SLEEK AND MODERN DESIGN. WHITE GEOMETRIC ENCLOSED DIFFUSER FRAMED IN BRONZE OR BRUSHED NICKEL SHIELD. FOR INDOOR OR OUTDOOR USE.

### WALL LANTERN

**P5736-09** Brushed Nickel

**P5736-129** Architectural Bronze

Can be used indoors or outdoors.

Size: 9-1/8" W., 10-1/4" ht.

Extends 3-3/4". H/CTR 5-5/8".

Lamp: One GU24 CFL lamp, 18w max.

ADA



## JACK CFL



P6045-31WB



P6046-31WB

RECTILINEAR DESIGN. BLACK FINISH WITH ETCHED OPAL GLASS SHADE.

### SMALL WALL LANTERN

**P6045-31WB** Black

Size: 6" W., 13-5/8" ht.

Extends 6-1/4". H/CTR 5-1/8".

Lamp: One GU24 base CFL lamp, 18w max. included.



### MEDIUM WALL LANTERN

**P6046-31WB** Black

Size: 8" W., 15-1/4" ht.


Extends 6-1/4". H/CTR 5-7/8".

Lamp: One GU24 base CFL lamp, 26w max. included.





## SHELTON

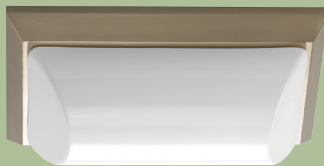

P5790-09



P5790-09

WHITE ACRYLIC DIFFUSER. MOUNTS VERTICALLY OR HORIZONTALLY. DIE-CAST ALUMINUM CONSTRUCTION.

## WALL LANTERN

**P5790-09** Brushed Nickel

Indoor or outdoor.

Size: 11" W., 5-5/8" ht.

Extends 3-3/4".

Lamp: One 13w 4-pin CFL.

G24q-1 base.

ADA



## ANDOVER CFL



P5888-20



P5887-20

ENERGY EFFICIENT LANTERNS WITH ETCHED GLASS. HINGED DOOR FOR EASY RELAMPING.

## WALL LANTERN

**P5887-20** Antique Bronze

Size: 5-1/2" W., 12-5/8" ht.

Extends 6-1/4". H/CTR 6-1/4".

Lamp: One GU24 CFL lamp, 13w max.



For incandescent versions see page 549.

## WALL LANTERN

**P5888-20** Antique Bronze

Size: 7-1/2" W., 21-1/4" ht.

Extends 8-1/4". H/CTR 7-1/2".

Lamp: One GU24 CFL lamp, 26w max.



Roman Coach CFL



P5766-09



P5766-31



P5766-20



P5770-09



P5770-20



P5770-31



P5772-20  
(shown without tail)



P5772-09  
(shown with tail)





P5772-31  
(shown with tail)

Product No.	Finish	Description	Size	Lamp(s)
P5766-09	Brushed Nickel	One-light wall lantern	6" W., 9-7/8" ht.	1 26w GU24
P5766-20	Antique Bronze		Extends 7".	CFL lamp
P5766-31	Black		H/CTR 3-1/2".	26w max.
P5770-09	Brushed Nickel	One-light wall lantern	7" W., 15-3/8" ht.	1 26w GU24
P5770-20	Antique Bronze		Extends 7-1/4".	CFL lamp
P5770-31	Black		H/CTR 6-7/8".	26w max.
P5772-09	Brushed Nickel	One-light wall lantern	7" W., 26-3/8" ht.	1 26w GU24
P5772-20	Antique Bronze		w/tail.	CFL lamp
P5772-31	Black		19-1/4" ht. w/o tail.	26w max.

\*\*\* Can be installed with or without tail.

A TIMELESS STYLE WITH ENVIRONMENTALLY FRIENDLY BENEFITS. ETCHED SEEDED GLASS IN BRUSHED NICKEL, ANTIQUE BRONZE OR BLACK FINISHES. SOLID BRASS AND ALUMINUM CONSTRUCTION.



Product No.	Finish	Description	Size	Lamp(s)
P5985-09WB	Brushed Nickel	One-light wall lantern	4-5/8" W., 10" ht.	1 26w GU24
P5985-20WB	Antique Bronze		Extends 6-1/8".	CFL lamp
P5985-31WB	Black		H/CTR 2-3/4".	(included) 
P5986-09	Brushed Nickel	One-light wall lantern	4-5/8" W., 8-1/2" ht.	1 13w GU24
P5986-20	Antique Bronze		Extends 6-1/8".	CFL lamp
P5986-31	Black		H/CTR 2-3/4".	

# Non-Metallic Lanterns

NON-METALLIC INCANDESCENT LANTERNS AVAILABLE IN CLASSIC WHITE OR BLACK FINISHES. CLASSIC OUTDOOR LANTERN LINES. CLEAR BEVELED ACRYLIC PANELS.

Product No.	Finish	Description	Size	Lamp(s)
P5456-30	White	One-light post lantern w/ beveled acrylic panels	8" sq., 18" ht.	1 medium base, 100w max.
P5456-31	Black		Fits 3" post (order separately).	
P5656-30	White	One-light wall lantern w/ beveled acrylic panels	8" W., 20" ht.	1 medium base, 100w max.
P5656-31	Black		Extends 9". H/CTR 15".	
P5657-30	White	One-light wall lantern w/ tail and beveled acrylic panels	8" W., 25" ht.	1 medium base, 100w max.
P5657-31	Black		Extends 9". H/CTR 15".	



Product No.	Finish	Description	Size	Lamp(s)
P5737-30	White	One-light wall lantern	8" W., 16" ht.	1 medium base, 60w max.
P5737-31	Black		Extends 8-1/2". H/CTR 13".	
P5738-30	White	One-light wall lantern with tail	8" W., 21" ht.	1 medium base, 60w max.
P5738-31	Black		Extends 8-1/2". H/CTR 13".	



## Newport Non-Metallic Lanterns

## Mansard



TIERED PAGODA OUTDOOR LIGHT FIXTURES.  
CLEAR PRISMATIC POLYCARBONATE DIFFUSERS.  
UV STABILIZED TO PREVENT FADING,  
POLYPROPYLENE LANTERNS WILL NOT RUST.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5444-30</b> <b>P5444-31</b>	White Black	One-light post lantern	10" dia., 10" ht. Fits 3" post (order separately).	1 medium base, 60w max.
<b>P5493-31</b>	Black	Two-light post lantern	28-3/4" W., 13" ht. Fits 3" post (order separately).	2 medium base, each 60w max.
<b>P5645-30</b> <b>P5645-31</b>	White Black	One-light wall lantern	10" W., 10" ht. Extends 11". H/CTR 5-1/2".	1 medium base, 60w max.

See page 298 for additional chain,  
and page 628 for posts.

FOUR-SIDED GAMBREL-STYLE HIP ROOF OUTDOOR  
LANTERNS IN CLASSIC WHITE OR BLACK FINISHES.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5414-30</b> <b>P5414-31</b>	White Black	One-light post lantern	8" sq., 12" ht. Fits 3" post (order separately).	1 medium base, 60w max.
<b>P5814-30</b> <b>P5814-31</b>	White Black	One-light wall lantern	8" W., 12-3/4" ht. Extends 8-1/4". H/CTR 10-5/8".	1 medium base, 60w max.
<b>P5815-30</b> <b>P5815-31</b>	White Black	One-light wall lantern with tail	8" W., 17" ht. Extends 8-1/4". H/CTR 10-5/8".	1 medium base, 60w max.



# Polycarbonate Lanterns

DURABLE CONSTRUCTION POLYCARBONATE LANTERNS.

Product No.	Finish	Description	Size	Lamp
P3213-30	White	One-light polycarbonate canopy with white shatter-resistant acrylic globe. UL approved for damp locations.	6" dia., 8" ht. Extends 5-3/4"	1 medium base, 60w max.
P5612-30	White	One-light polycarbonate wall lantern with clear lexan diffuser	4-3/4" W., 7-1/4" ht. Extends 5-3/4". H/CTR 2-1/2".	1 medium base, 60w max.
P5612-31	Black			
P5813-30	White	One-light polycarbonate wall bracket with 6" acrylic globe	6" W., 7-3/4" ht. Extends 6-1/2". H/CTR 2-1/2".	1 medium base, 60w max.
P5813-31	Black			
P5817-31	Black	One-light polypropylene wall lantern with white cylindrical acrylic diffuser	4-3/8" W., 7" ht. Extends 5-3/4". H/CTR 3-1/4"	1 medium base, 60w max.
P5818-30	White	One-light polypropylene wall lantern with textured acrylic panels	7-1/4" W., 7-3/4" ht. Extends 5-3/4". H/CTR 2-1/2".	1 medium base, 60w max.
P5818-31	Black			
P5844-30	White	One-light polypropylene wall bracket with white acrylic "acorn" diffuser	6" W., 8-3/4" ht. Extends 7-1/4". H/CTR 3".	1 medium base, 60w max.
P5844-31	Black			



## White Acrylic Globes


SHATTER-RESISTANT GLOBE IDEAL FOR RANGE OF OUTDOOR AREAS, CAST ALUMINUM WALL MOUNTS IN WHITE OR BLACK FINISH.

Product No.	Finish	Description	Size	Lamp
<b>P5426-60</b>	White	One-light post lantern white fitter	12" dia., 13" ht. Fits 3" post (order separately).	1 medium base, 100w max.
<b>P5436-60</b>	White	One-light post lantern white fitter	14" dia., 15" ht. Fits 3" post (order separately).	1 medium base, 150w max.
<b>P5446-60</b>	White	One-light post lantern white fitter	16" dia., 17" ht. Fits 3" post (order separately).	1 medium base, 200w max.
<b>P5478-60</b>	White	One-light post lantern with black polycarbonate fitter. Twist-lock globe.	10" dia., 10-1/4" ht. Fits 3" post (order separately).	1 medium base, 100w max.
<b>P5626-60</b>	Black	One-light cast aluminum wall torch	8" W., 15" ht. Extends 10". H/CTR 8".	1 medium base, 100w max.
<b>P5636-60</b>	Black	One-light cast aluminum wall torch	10" W., 17" ht. Extends 11". H/CTR 10-3/8".	1 medium base, 150w max.



## Milford CFL

DURABLE ALUMINUM CONSTRUCTION WITH POWDER COAT FINISH AND WHITE MATTE ACRYLIC DIFFUSER.

Product No.	Finish	Size	Lamp
<b>P5821-20</b>	Antique Bronze	5-3/4" W., 8-3/4" ht.	1 13w GU24 CFL
<b>P5821-31</b>	Black	Extends 4-5/8". H/CTR 5-1/8"	



See page 298 for additional chain, and page 628 for posts.

## Post Lantern

TEXTURED CLEAR POLYCARBONATE DIFFUSER. DURABLE UV RESISTANT MOLDED FITTER.

Product No.	Finish	Size	Lamp
<b>P6408-31</b>	Black	11" dia., 16-1/2" ht. Fits 3" post (order separately)	1 medium base 150w max.



## Non-Metallic LED PROGRESS LED

120/277V INPUT VOLTAGE. DURABLE NON-CORROSIVE  
UV RESISTANT HOUSING AND DIFFUSER. THERMALLY  
PROTECTED LED ARRAY, 4000K. WET LOCATION LISTED.

Product No.	Finish	Description	Size	Lamp(s)
<b>P3715-31</b>	Black	Wall lantern. 11.3w input power. Extends 7".	6" sq., 9" ht. H/CTR 4-1/4"	4 LED array 10w



P3715-31

## Non-Metallic Flush Mount

WHITE OR BLACK FINISH, TOP FRAME FEATURES SUBTLE  
DETAILING AND TEXTURED WHITE ACRYLIC LENS.

Product No.	Finish	Description	Size	Lamp(s)
<b>P7340-30WB</b>	White	One-light close- to-ceiling.	8-1/4" sq., 4-5/8" ht.	1 26w GU24 CFL lamp (included)
<b>P7340-31WB</b>	Black			



P7340-31WB



P7340-30WB

## Non-Metallic Energy Star

CLASSIC WHITE OR BLACK ENERGY STAR  
QUALIFIED OUTDOOR LANTERNS.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5816-30WB</b>	White	One-light polycarbonate wall lantern	6" W., 7-3/4" ht. Extends 6-1/2".	1 18w CFL GU24 base (included)
<b>P5816-31WB</b>	Black			
<b>P5843-30WB</b>	White	One-light wall lantern	8-1/4" W., 17-5/8" ht. Extends 8-1/2" H/CTR 9-3/4".	1 18w CFL GU24 base (included)
<b>P5843-31WB</b>	Black			
<b>P5881-30WB</b>	White	One-light wall lantern w/white acrylic	6" W., 8-7/8" ht. Extends 6-7/8". H/CTR 4-1/8".	1 18w CFL. GU24 base (included)
<b>P5881-31WB</b>	Black			



P5843-31WB



P5816-31WB

P5816-30WB



P5881-30WB

P5881-31WB

## Polycarbonate Bulkheads

VIRTUALLY MAINTENANCE FREE FIXTURES. INSTALL ON CEILINGS OR WALLS. CLASSIC WHITE DETAILS AND TRIM, CORROSION AND IMPACT AND SHATTER RESISTANT, UV STABILIZED.

Product No.	Finish	Description	Mounting	Size	Lamp(s)
<b>P5702-30</b>	White	Round	Wall or ceiling	10" dia., Extends 4-3/4".	1 medium base, 75w max.
<b>P5703-30</b>	White	Round with grill	Wall or ceiling	10" dia., Extends 5".	1 medium base, 75w max.
<b>P5704-30</b>	White	Oval	Wall	10" L., 5-5/8" W. Extends 3-3/4".	1 medium base, ADA 60w max.
<b>P5705-30</b>	White	Oval with grill	Wall	10-1/2" L., 5-7/8" W. Extends 4".	1 medium base, ADA 60w max.
<b>P5706-30</b>	White	Hooded	Wall	10-1/2" L., 5-7/8" W. Extends 4".	1 medium base, ADA 60w max.



P5704-30

P5705-30  
P7338-30EBWB

P5702-30

P5703-30  
P7337-30EBWBP5706-30  
P7339-30EBWB

Product No.	Finish	Description	Ballast	Size	Lamp(s)
<b>P7337-30EBWB</b>	White	Two-light round wall or ceiling mount.	120V NPF electronic	11" dia. Extends 6-1/2". 5-1/8" ht.	2 13w triple tube CFL. GX24q-1 base. (included)
<b>P7338-30EBWB</b>	White	Two-light oval wall or ceiling mount.	120V NPF electronic	6-3/4" W., 10-5/8" L., 4" ht.	2 13w triple tube CFL. ADA GX24q-1 base. (included)
<b>P7339-30EBWB</b>	White	Two-light oval wall	120V NPF electronic	6-3/4" W., 10-5/8" L., 4" ht.	2 13w triple tube CFL. ADA GX24q-1 base. (included)



## Non-Metallic CFL

ENERGY EFFICIENT FIXTURES FOR WALLS OR CEILINGS. NON-METALLIC COMPONENTS.

Product No.	Finish	Description	Size	Ballast	Lamp(s)
<b>P3623-30</b>	White	One-light ceiling mount with shatter resistant 6" globe.	6" dia., 7-1/4" ht.	120V NPF	1 7w 2-pin twin CFL. G23 base.
<b>P7118-30</b>	White	Two-light	12" sq., 2-1/4" ht.	120V NPF	2 13w 2-pin twin CFL. GX23 base.
<b>P7182-30</b>	White	Two-light	9-1/2" sq., 2" ht.	120V NPF	2 7w or 2 9w 2-pin twin CFL. G23 base.



P3623-30



P7182-30



P7118-30

# Utility

DRESS UP ESSENTIAL LIGHTING WITH FINESSE  
TO MATCH ANY DÉCOR, GLOBE OR CYLINDRICAL  
MARINE GLASS FOR CLEAN, MINIMALIST LOOK.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5602-30</b> <b>P5602-31</b>	White Black	One-light with clear marine glass	4-1/2" W., 7-1/4" ht. Extends 5-1/2". H/CTR 2-1/4".	1 medium base, 75w max.
<b>P5603-30</b> <b>P5603-31</b>	White Black	One-light with clear marine glass	4-7/8" dia., 6-1/4" ht.	1 medium base, 60w max.
<b>P5604-30</b> <b>P5604-31</b>	White Black	One-light with white 6" glass globe	6" W., 8-1/2" ht. Extends 6-1/2". H/CTR 2-1/4".	1 medium base, 100w max.



P5604-30

P5604-31



P5602-30



P5602-31



P5603-30



P5603-31

# Ceiling Mount

ANTIQUE BRONZE, WHITE OR BLACK FINISH,  
TEXTURED GLASS OR WHITE ACRYLIC PANELS.

## METAL

Product No.	Finish	Description	Size	Lamp(s)
<b>P5727-20</b> <b>P5727-31</b>	Antique Bronze Black	One-light ceiling light. Textured glass.	7-1/2" sq., 5" ht.	1 medium base, 60w max.
<b>P5729-20</b> <b>P5729-31</b>	Antique Bronze Black	Two-light ceiling light. Textured glass.	9-1/4" sq., 5" ht.	2 medium base, each 60w max.

## POLYCARBONATE

Product No.	Finish	Description	Size	Lamp(s)
<b>P5744-30</b> <b>P5744-31</b>	White Black	Ceiling light with white acrylic panels	8-1/4" sq., 4-3/4" ht.	1 medium base, 60w max.
<b>P5745-30</b> <b>P5745-31</b>	White Black	Ceiling light with white acrylic panels	10-1/4" sq., 5-1/2" ht.	2 medium base, each 60w max.

See page 574 for CFL versions and page 577 for LED versions of this fixture.



P5727-20



P5729-31



P5744-31



P5745-31



P5745-30



## Hard-Nox®

THREADED OPAL GLASS SHADES SCREW  
DIRECTLY INTO FITTERS. VAPOR-PROOF  
GASKETS AND PORCELAIN SOCKETS.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5510-16</b>	Satin Aluminum	One-light ceiling fixture	4-3/4" dia., 6-3/4" ht.	1 medium base, 60w max.
<b>P5511-16</b>	Satin Aluminum	One-light wall fixture	4-1/2" W., 6-3/4" ht.	1 medium base, 100w max.
<b>P5511-31</b>	Black		Extends 4-3/4" H/CTR 3-1/4".	
<b>P5512-16</b>	Satin Aluminum	Two-light wall fixture. Mount horizontally or vertically.	4-1/2" W., 13" ht. Extends 6". H/CTR 6-1/2".	2 medium base, each 100w max.
<b>P5616-16</b>	Satin Aluminum	One-light ceiling fixture	6" dia., 7-1/2" ht.	1 medium base, 60w max.



## Beveled Glass

OCTAGONAL CLOSE-TO-CEILING FIXTURES. CLEAR,  
BOUND BEVELED GLASS. DAMP LOCATION LISTED.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5788-09</b>	Brushed Nickel	Three-light	9" dia., 7" ht.	3 candelabra base, each 25w max.*
<b>P5788-10</b>	Polished Solid Brass			
<b>P5788-20</b>	Antique Bronze			
<b>P5789-09</b>	Brushed Nickel	Four-light	12" dia., 7" ht.	4 candelabra base, each 25w max.*
<b>P5789-10</b>	Polished Solid Brass			
<b>P5789-20</b>	Antique Bronze			

\*G16.5 lamp recommended



VARIETY OF GEOMETRIC SHAPES IDEAL FOR WIDE RANGE OF OUTDOOR AREAS, IMPACT RESISTANT DURABILITY WITH POLYCARBONATE OR ACRYLIC DIFFUSERS, WET LOCATION LISTED FOR INDOOR OR OUTDOOR USE, CLASSIC WHITE, BLACK OR SATIN ALUMINUM FINISHES.

## Hard-Nox® Incandescent



P5691-60



P5691-68



P5695-16



P5791-60



P5791-68



P5710-31



P5711-31

Product No.	Finish	Polycarbonate Diffuser	Mounting	Size	Lamp(s)
<b>P5691-60</b> <b>P5691-68</b>	White	White ribbed Clear prismatic	Wall and ceiling	5-3/4" W., 8-1/4" ht. Extends 4-3/8". H/CTR 4-1/8"	1 medium base, 75w max.
<b>P5695-16</b>	Satin Aluminum	White	Wall	4-1/2" W., 6-3/4" ht. Extends 4-3/4". H/CTR 3-1/4"	1 medium base, 60w max.
<b>P5710-31</b>	Black	White	Wall and ceiling	8-3/4" dia., 5-1/4" ht.	1 medium base, 75w max.
<b>P5711-31</b>	Black	White	Wall and ceiling	12" dia., 5-1/4" ht.	2 medium base, each 75w max.
<b>P5791-60</b> <b>P5791-68</b>	White	White ribbed Clear prismatic	Wall and ceiling	10-1/2" sq., 4" ht.	2 medium base, ADA each 75w max.

VARIETY OF GEOMETRIC SHAPES IDEAL FOR ENERGY EFFICIENT ILLUMINATION. IMPACT RESISTANT DURABILITY WITH POLYCARBONATE OR ACRYLIC DIFFUSERS, WET LOCATION LISTED FOR INDOOR OR OUTDOOR USE, CLASSIC WHITE OR BLACK FINISHES.

## Hard-Nox® CFL



P5694-60



P7124-68



P7372-30  
P7372-30STRWB










P7376-31



P7375-30STRWB



P7373-30

Product No.	Finish	Diffuser	Dimensions	UL Listing	Ballast	Lamp(s)	
<b>P5694-60</b>	White	White ribbed polycarbonate	5-3/4" W., 8-1/4" ht. Extends 4-3/8". H/CTR 4-1/8".	Wet	120V HPF magnetic	1 2-pin twin 9w CFL. G23 base.	
<b>P7124-60</b> <b>P7124-68</b>	White	White ribbed DR acrylic Clear prismatic DR acrylic	4-1/4" W., 12-1/4" ht. Extends 4-1/4". H/CTR 6-1/8".	Damp	120V HPF magnetic	1 2-pin twin 13w CFL. GX23 base.	
<b>P7372-30</b>	White	White DR acrylic	13-3/4" dia., 3-1/4" ht.	Damp	120V NPF Rapid start	1 22w FC8T9 and 1 32w FC12T9 circline	ADA HPF 
<b>P7372-30STRWB</b>	White	White DR acrylic	13-3/4" dia., 3-1/4" ht.	Damp	120V NPF electronic	2 13w 4-pin Quad CFL. G24q-1 base. (incl)	ADA 
<b>P7373-30</b>	White	White DR acrylic	19" dia., 4-1/4" ht.	Damp	120V HPF Rapid start	1 40w FC16T9 and 1 32w FC12T9 circline	
<b>P7375-30STRWB</b>	White	One-light	9" dia., 3-1/4" ht.	Damp	120V NPF electronic	1 13w 4-pin Quad CFL. G24q-1 base. (incl)	ADA 
<b>P7376-30</b> <b>P7376-31</b>	White Black	White DR acrylic	11" dia. 3-1/4" ht.	Damp	120V NPF magnetic	2 2-pin twin 13w CFL. GX23 base.	ADA 

## Aluminum LED Cylinders



### LED CYLINDER FEATURES

- 120v AC
- 1000 lumens (17w)  
2000 lumens (29w)
- 3000K color temperature
- Dimmable to 10% brightness  
with ELV type dimmers

### 6" ALUMINUM CYLINDERS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5641-20/30K</b>	Bronze	One-light down*	6" W., 12" ht. Extends 8-7/8". H/CTR 4-1/2".	1 integral 29w LED module included
<b>P5641-30/30K</b>	White			
<b>P5641-31/30K</b>	Black			
<b>P5641-82/30K</b>	Metallic Gray			
<b>P5642-20/30K</b>	Bronze	Two-light up/down. For wet location specify P8798 top cover lens.	6" W., 18" ht. Extends 8-7/8". H/CTR 8".	2 integral 29w LED modules included
<b>P5642-30/30K</b>	White			
<b>P5642-31/30K</b>	Black			
<b>P5642-82/30K</b>	Metallic Gray			
<b>P5741-20/30K</b>	Bronze	One-light cylinder. Mounts flush to ceiling or hangs with pendant accessory kit (pg. 301).	6" dia., 12" ht.	1 integral 29w LED module included
<b>P5741-30/30K</b>	White			
<b>P5741-31/30K</b>	Black			


\*Dark sky.

SLEEK, CYLINDRICAL FORMS IN ELEGANT FINISH SELECTIONS. DIE-CAST ALUMINUM WALL BRACKETS AND HEAVY-DUTY ALUMINUM FRAMING, FADE AND CHIP-RESISTANT. UL LISTED FOR WET LOCATIONS WHEN USED WITH LENS COVER.

5" ALUMINUM CYLINDERS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5674-20/30K</b>	Bronze	One-light down* 5" W., 7-1/4" ht. Extends 8". H/CTR 2-1/2".		1 integral 17w LED module included
<b>P5674-30/30K</b>	White			
<b>P5674-31/30K</b>	Black			
<b>P5674-82/30K</b>	Metallic Gray			
<b>P5675-20/30K</b>	Bronze	Two-light up/down For wet locations specify P8799 top cover lens.	5" W., 14" ht. Extends 8". H/CTR 7".	2 integral 17w LED modules included
<b>P5675-30/30K</b>	White			
<b>P5675-31/30K</b>	Black			
<b>P5675-82/30K</b>	Metallic Gray			
<b>P5774-20/30K</b>	Bronze	One-light. Mounts flush to ceiling*	5" dia., 6-1/2" ht.	1 integral 17w LED module included
<b>P5774-30/30K</b>	White			
<b>P5774-31/30K</b>	Black			

\*Dark sky.

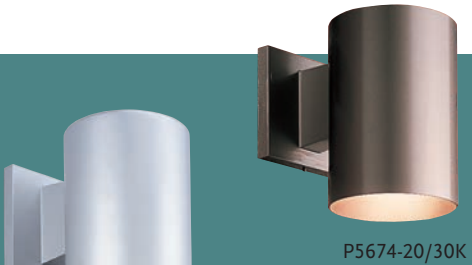

P5674-20/30K



P5674-82/30K



P5674-30/30K



P5674-31/30K



P5774-31/30K



P5774-30/30K



P5774-20/30K



P5675-82/30K



P5675-20/30K



P5675-31/30K

See page 624 for accessories.



Aluminum  
Cylinders



SLEEK, CYLINDRICAL FORMS IN ELEGANT FINISH SELECTIONS. DIE-CAST ALUMINUM WALL BRACKETS AND HEAVY-DUTY ALUMINUM FRAMING, FADE AND CHIP-RESISTANT. UL LISTED FOR WET LOCATIONS WHEN USED WITH LENS COVER.

#### 5" ALUMINUM CYLINDERS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5674-20</b>	Bronze	One-light down*	5" W., 7-1/4" ht. Extends 8". H/CTR 2-1/2".	1 75w PAR-30 or 75w BR-30
<b>P5674-30</b>	White			
<b>P5674-31</b>	Black			
<b>P5674-82</b>	Metallic Gray			
<b>P5675-20</b>	Bronze	Two-light up/down For wet locations specify P8799 top cover lens.	5" W., 14" ht. Extends 8". H/CTR 7".	2 75w PAR-30
<b>P5675-30</b>	White			
<b>P5675-31</b>	Black			
<b>P5675-82</b>	Metallic Gray			
<b>P5774-20</b>	Bronze	One-light. Mounts flush to ceiling*	5" dia., 6-1/2" ht.	1 75w PAR-30 or 75w BR-30
<b>P5774-30</b>	White			
<b>P5774-31</b>	Black			

\*Dark sky.




P5774-31




P5774-30



P5774-20

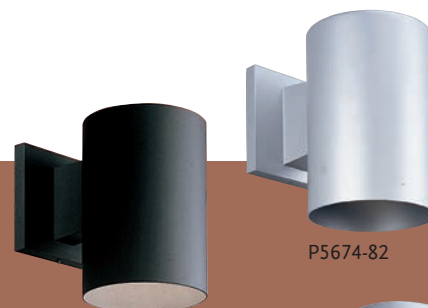


P5674-31

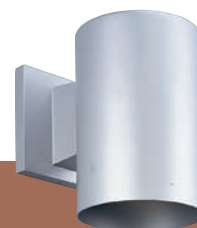

P5674-82



P5675-20

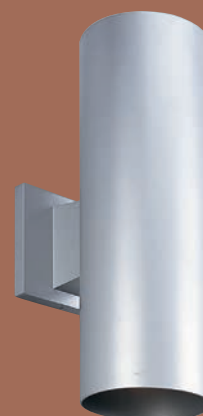

P5675-82

#### 6" ALUMINUM CYLINDERS

Product No.	Finish	Description	Size	Lamp(s)
<b>P5641-20</b>	Bronze	One-light down*	6" W., 12" ht. Extends 8-7/8". H/CTR 4-1/2".	1 250w PAR-38 or 150w BR-40
<b>P5641-30</b>	White			
<b>P5641-31</b>	Black			
<b>P5641-82</b>	Metallic Gray			
<b>P5642-20</b>	Bronze	Two-light up/down. For wet location specify P8798 top cover lens.	6" W., 18" ht. Extends 8-7/8". H/CTR 8".	2 250w PAR-38 or 150w BR-40
<b>P5642-30</b>	White			
<b>P5642-31</b>	Black			
<b>P5642-82</b>	Metallic Gray			
<b>P5741-20</b>	Bronze	One-light cylinder. Mounts flush to ceiling or hangs with pendant accessory kit (pg. 624).	6" dia., 12" ht.	1 250w PAR-38 or 150w BR-40
<b>P5741-30</b>	White			
<b>P5741-31</b>	Black			

\*Dark sky.



P5642-20



P5741-31



P5741-30

# Aluminum Squares

HEAVY-DUTY ALUMINUM CONSTRUCTION, DIE-CAST ALUMINUM WALL BRACKET. UL LISTED FOR WET LOCATIONS. POWDER COAT FOR CHIPPING AND FADING RESISTANCE. DARK SKY COMPLIANT DOWN LIGHT ONLY.

Product No.	Finish	Description	Size	Lamp(s)
<b>P5643-20</b>	Bronze	One-light 6" square	6" W., 12" ht. Extends 8-7/8". H/CTR 4-1/2".	1 250w PAR-38 or 150w BR-40
<b>P5643-30</b>	White			
<b>P5643-31</b>	Black			
<b>P5644-20</b>	Bronze	Two-light 6" up/down square*	6" W., 18" ht. Extends 8-7/8". H/CTR 8".	2 250w PAR-38 or 150w BR-40
<b>P5644-30</b>	White			
<b>P5644-31</b>	Black			

\*For use in wet locations, specify P8797-31 top cover.

\*Dark sky.



## Accessories for Squares & Cylinders

### DEEP GROOVE STEP BAFFLES

Black anodized aluminum to minimize glare


Product No.	Finish	Description	Size
<b>P8710-31</b>	Black	Deep groove step baffle for P5641, P5642 and P5741 6" cylinders.	6" dia., 4" ht.



### PENDANT KIT

Pendant kit adapts P5741 ceiling fixture to 6", 12" or 18" stem mounting. Includes canopy, hang-straight swivel, 6" and 12" sections with coupling.

Product No.	Finish	Description
<b>P8741-20</b>	Bronze	Pendant kit for P5741
<b>P8741-30</b>	White	
<b>P8741-31</b>	Black	

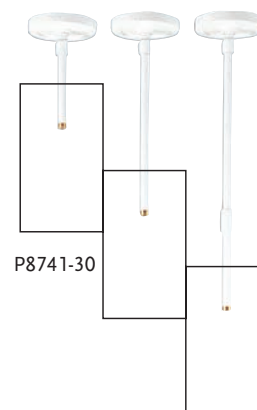

### TOP COVER LENS

Adapts up/down fixtures for wet location use. Heat & shatter-resistant clear tempered lens w/black trim.

Product No.	Finish	Description	Size
<b>P8797-31</b>	Black	Top cover lens for P5644 6" squares	6" sq.
<b>P8798-31</b>	Black	Top cover lens for P5642 6" cylinders	6" dia.
<b>P8799-30</b> <b>P8799-31</b>	White Black	Top cover lenses for P5675 & P5713 5" cylinders	5" dia.



# Polymeric Cylinders

SLEEK, CYLINDRICAL FORMS IDEAL FOR COASTAL LOCATIONS. UP OR DOWN CONFIGURATION. NON-CORROSIVE COMPONENTS WITHSTAND SALT, WIND, SAND, WATER AND SUN. DOWN VERSION SHIELDS PAR LAMP AND BUG LIGHTS TO MINIMIZE GLARE ONTO BEACH FOR TURTLE LAW COMPLIANCE. WET LOCATION LISTED. DARK SKY COMPLIANT DOWN LIGHT ONLY.

Product No.	Finish	Description	Size	Lamp(s)
P5712-30	Textured White	One-light polymeric cylinder	5" W., 7-1/4" ht.	1 75w PAR-30 or 65w BR-30
P5712-31	Black		Extends 7-3/4"	
P5713-30	Textured White	Two-light polymeric cylinder*	5" W., 14" ht.	2 75w PAR-30 or 65w BR-30
P5713-31	Black		Extends 7-3/4"	
P8712-30	Textured White	Turtle-friendly accessory	5" dia., 4" ht.	n/a
P8712-31	Black			



\*Wet location listed with P8798 top cover.



# Sea Turtle Friendly

ACCESSORY PROVIDES ADDITIONAL SHIELDING OF THE LIGHT SOURCE TO ACHIEVE "TURTLE-FRIENDLY" ILLUMINATION. Check with your local turtle enforcement official.

P8712-30 White  
P8712-31 Black  
Size: 5" dia., 4" ht.

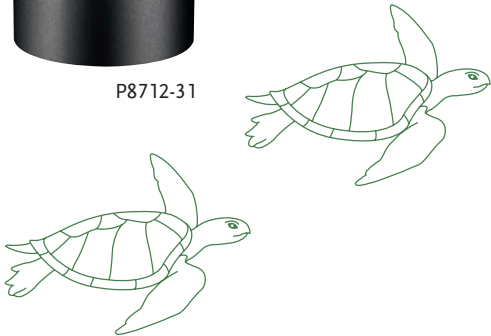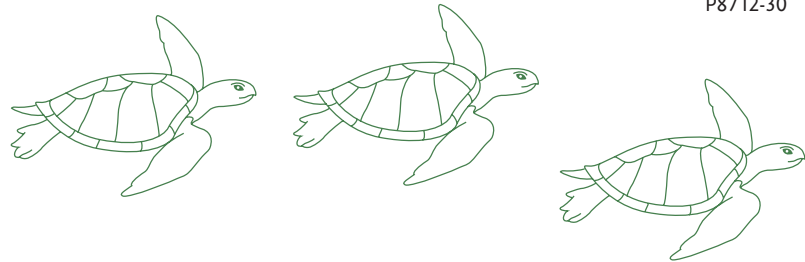

LONG LAMP LIFE (50,000 HOURS) AND WEATHER RESISTANT. HOUSING CONSTRUCTED FROM HIGH-GRADE POLYPROPYLENE. STAINLESS STEEL MOUNTING HARDWARE AND LAMPS INCLUDED. COMPLIES WITH MUNICIPAL CODES THAT REQUIRE ILLUMINATED HOUSE NUMBERS. ORDER 16V TRANSFORMER SEPARATELY.

## Address Lights

### ADDRESS LIGHT HOUSING

Numbers, letters and blanks must be ordered separately from address light fixture. \* Not UL Listed

Product No.	Finish	Description	Size	Lamp(s)
<b>P5968-31WB*</b>	Black	Two-light address light housing 12V	12-1/2" W., 6-3/4" ht. Extends 2-1/4".	2 T-3/1/4 5w Xenon wedge base lamps included.
<b>P5969-01</b>	n/a	Transformer 16V 10w for P5968	2" W., 1-3/4" L.	n/a



P5968-31WB



P5969-01

### ADDRESS NUMBERS

Numbers, letters and blanks must be ordered separately from address light fixture, P5968. Ten numbers per pack. Not UL Listed.

Product No.	Description	Size
<b>P5970-000</b>	0	2-1/4" W., 5" ht.
<b>P5970-001</b>	1	
<b>P5970-002</b>	2	
<b>P5970-003</b>	3	
<b>P5970-004</b>	4	
<b>P5970-005</b>	5	
<b>P5970-006</b>	6 or 9	
<b>P5970-007</b>	7	
<b>P5970-008</b>	8	
<b>P5970-HLF</b>	1/2	
<b>P5970-FBK</b>	Full Blank	

**P5970-HBK** Half Blank 1-1/8" W., 5" ht.



P5970-000



P5970-001



P5970-002



P5970-003



P5970-004



P5970-005



P5970-006\*



P5970-007



P5970-008



P5970-FBK



P5970-HBK



P5970-HLF

## Door Chime

INCLUDES TRANSFORMER, CHIME ASSEMBLY AND LIGHTED PUSH BUTTON.

Product No.	Finish	Description	Size
<b>PC001-30</b>	Textured White	One-chime kit with 10va transformer	4" W., 7-3/16" ht. Depth 2".



PC001-30



# Non-Metallic Par Lampholders

IDEAL FOR ENVIRONMENTAL  
CONDITIONS WHERE METALLIC FIXTURES  
ARE UNDESIRABLE. UV STABILIZED  
NON-METALLIC MATERIALS AND NON-  
CORROSIVE HARDWARE.

## Par Lampholders

**P5212-20** Bronze

**P5212-30** White

Double non-metallic PAR  
lampholder.

Size: 11" W., 4-5/8" ht. Extends 5".

Lamp: One PAR 38, 120w max.


**P5214-30** White

PAR lampholder shroud for  
P5212.

Size: 6-5/8" dia., 5-1/8" ht.



P5212-30

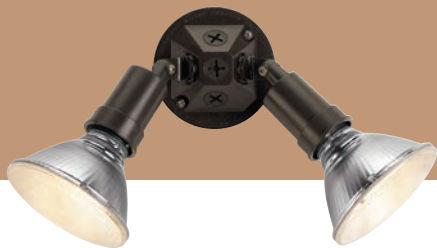

P5212-20



P5214-30



P5202-31



P5202-20



P5207-30



P5203-31



P5203-20

**P5202-20** Bronze

**P5202-31** Black

Single painted adjustable swivel  
floodlight. Aluminum construction.  
Locking adjustment.

Size: 5-7/8" dia., 9" height

Lamp: One PAR38, 150w max.

**P5207-30** White

Two painted adjustable  
swivel floodlights. Aluminum  
construction. Locking adjustment.

Size: 4-7/8" dia., 6-3/4" ht.

Lamps: Two PAR20, PAR30 or  
PAR38, each 150w max.

**P5203-20** Bronze

**P5203-30** White

**P5203-31** Black

Two painted adjustable swivel  
floodlights with lamp shroud.  
Aluminum construction.

Size: 6-1/4" dia., 9" ht.

Lamps: Two PAR38, each 150w max.

# Posts

SURROUND YOUR HOME WITH DECORATIVE POSTS TO ADD STYLE AND ELEGANCE FOR YEARS TO COME, ALUMINUM CONSTRUCTION AND POPULAR FINISH CHOICES ADD TO FUNCTIONALITY OF OUTDOOR LIGHTING.

Product No.	Finish	Description	Size
P5390-20 P5390-31	Antique Bronze Black	Aluminum post.	3" dia., 7' ht. (Can be cut to desired length)
P5390-31PC	Black	Aluminum post with photocell which automatically turns on at dusk, off at dawn.	3" dia., 7' ht. (Can be cut to desired length)
P5391-30 P5391-31	White Black	Aluminum post with ladder rest.	3" dia., 7' ht. (Can be cut to desired length)
P5391-20PC P5391-31PC	Antique Bronze Black	Aluminum post with ladder rest and photocell which automatically turns lantern on at dusk and off at dawn.	3" dia., 7' ht. (Can be cut to desired length)
P5392-31PC	Black	Black aluminum post with ladder rest, photocell which automatically turns on at dusk off at down and weather proof GCO.	3" dia., 7' ht. (Can be cut to desired length)
P5394-20 P5394-31	Antique Bronze Black	Commercial grade black aluminum post, .125 wall thickness.	3" dia., 12' ht. (Can be cut to desired length)



# Post Accessories

ALUMINUM CONSTRUCTION OFFERS VIRTUALLY MAINTENANCE-FREE BENEFITS AND STURDY OPERATION THAT WILL LAST OVER TIME.

Product No.	Finish	Description	Size
P8726-20 P8726-31 P8726-46	Antique Bronze Black Weathered Bronze	Cast aluminum pedestal mount. For mounting post lanterns with 3" fitters on pedestals or on top of walls.	7" dia., 3-1/4" ht.
P8748-31	Black	Surface Mount Post Adapter Flanged cast aluminum base for surface mounting round 3" bottom O.D. posts. Anchor bolts and allen set screws included.	8" dia., 5" ht.



# Wall Packs

## METAL HALIDE


**PHFC-100P-B** Antique Bronze  
Die-cast aluminum housing and door. Reflector for uniform full cutoff. 120/208/240/277V pulse start metal halide.  
Size: 14-1/4" W., 9-1/4" ht.  
Extends 11-1/2".  
Lamp: One metal halide lamp, 100w max.



PHFC-100P-B

## METAL HALIDE

**PHGH-100P-B** Antique Bronze  
Cast aluminum housing with borosilicate glass refractor, 1/2" conduit and photocell hubs.  
120/208/240/277V pulse start metal halide.  
Size: 8-1/2" W., 8-1/2" ht.  
Extends 8-1/2".  
Lamp: One metal halide lamp, 100w max.

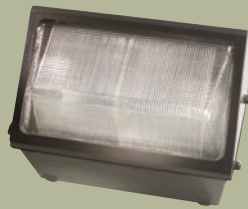

PHGH-100P-B

## METAL HALIDE

**PHGH-150P-B** Antique Bronze  
Cast aluminum housing with borosilicate glass refractor, 1/2" conduit and photocell hubs.  
120/208/240/277V pulse start metal halide.  
Size: 8-1/2" W., 8-1/2" ht.  
Extends 8-1/2".  
Lamp: One metal halide lamp, 150w max.



PHGH-150P-B

## METAL HALIDE

**PHGH-250P-B** Antique Bronze  
Cast aluminum housing with borosilicate glass refractor, 1/2" conduit and photocell hubs.  
120/208/240/277V pulse start metal halide.  
Size: 8-1/2" W., 8-1/2" ht.  
Extends 8-1/2".  
Lamp: One metal halide lamp, 250w max.



PHGH-250P-B

## LED

**PHSL-13-23B** Antique Bronze  
Die-cast aluminum housing with tempered, impact resistant clear glass lens. 23.3w input power. 1184 lumens. 120V/277V driver. 5000K color temperature.  
Size: 12-3/4" W., 6-3/4" ht.  
Extends 7-1/4".  
Lamp: One integral 23w LED module included.



PHSL-13-23B

## CFL

**P5891-20** Antique Bronze  
Two-light CFL w/photocell. 120V NPF electronic ballast.  
Size: 5-1/2" W., 14-5/8" ht.  
Extends 6-3/8".  
Lamp: Two 13w 4-pin CFL lamps, GX23 base.



P5891-20



# Landscape Lighting Design Techniques for Creating Dramatic Effects



PATH LIGHTING



Lighting along paths and driveways enhances the overall theme of your outdoor space while preventing accidents in the dark.

- Position lights on alternate sides for even illumination
- Define edges by positioning lights about one foot from one or both sides of the path
- Position lights to avoid shadows when used at steps, as well as away from plants so they don't interfere with light distribution

UPLIGHTING



Highlight or accent distinct plants, trees or accessories in your yard by positioning in-ground lights close to your focal point.

The best way to enhance the texture of objects outdoors is by mounting spotlight or floodlight fixtures on the ground.

SECURITY LIGHTING



Decorative outdoor lighting designs can also add security features for your home. The majority of residential crimes take place after dark – when thieves feel they cannot be seen.

A well-lit yard can be an excellent crime prevention method and fixtures designed specifically for security, like motion sensors, can add extra protection and convenience. Consider using PAR lampholders on the corners aimed down each wall of your home.



PROGRESS LIGHTING OFFERS THE FOLLOWING TIPS AND DESIGN TECHNIQUES TO FOLLOW WHEN PLANNING LANDSCAPE DESIGN, ENSURING YOUR YARD WILL BE A WONDERFUL ENVIRONMENT WHERE YOUR FRIENDS AND FAMILY CAN RELAX.

### ACCENT LIGHTING



Also known as spot lighting, this effect uses cross lighting and uplighting techniques to showcase a particular item in your garden with bright light in an otherwise dark area. Use an accessory shield to avoid glare.

### DECKS AND PORCHES



It's important to outline the perimeters of the deck and railings, as well as provide safety for nighttime use on decks and outdoor porches. Use low voltage (12V) fixtures for maximum electrical safety.

### GRAZING



Grazing light is an effect that illuminates the outline of a particular tree, shrub or architectural feature to enhance its shape and texture. This must be done precisely and is usually requires mounting a carefully positioned spotlight 6 to 12 inches from the surface.

### SHADOWING



Add an elegant, but mysterious, touch to your outdoor design with this effect. Shadow lighting is typically achieved with uplighting placed out of sight to create silhouette images of trees, plants, and accessories.

### SILHOUETTING



Produce an awe-inspiring effect by placing light fixtures directly behind your subject. Lights mounted near the bottom of a tree or shrub will cast the plant's shadow against the sky for an intriguing twilight display. This technique is often used near the home for an appealing façade.

### STEP LIGHTING



To increase safety, step lighting uses small fixtures that are typically shielded to cast a soft, glare-free light across steps and decks.

Install one step light on every other riser and use louvered wall plates to avoid glare.



## LED Landscape

VARIETY OF LED LANDSCAPE LIGHTING OPTIONS FOR POPULAR EXTERIOR APPLICATIONS. LOW VOLTAGE LED LANDSCAPE, BOLLARD AND PATH LIGHTS ENHANCE OUTDOOR SETTINGS, WHILE ADDING SAFETY, SECURITY AND CURB APPEAL TO AREAS AROUND THE HOME. 3000K COLOR TEMPERATURE.

### PATH LIGHT

**P5245-20** Antique Bronze\*

**P5245-31** Black\*

Die cast aluminum construction. Includes stake and deck mount, 4' cable and connector.

Size: 6-1/2" dia., 20-3/4" ht.

Extends 9-1/2".

Lamp: One 1.5w LED module included.

### LINEAR PATH LIGHT

**P5246-31** Black\*

Linear path light with ground stake.

Die cast aluminum construction with louvered glass.

Size: 5-3/8" W., 2-5/8" ht.

Lamp: One 1.5w LED module included.



P5245-31



P5245-20



P5246-31

### BOLLARD

**P5247-09** Brushed Nickel\*

**P5247-31** Black\*

Slim bollard with cast aluminum construction. Frosted internal diffuser surrounded by clear plastic.

Size: 2-5/8" dia., 24" ht.

Lamp: One 1.5w LED module included.

### SPREAD LIGHT

**P5297-31** Black\*

Die cast aluminum construction.

Includes stake and deck mount, 4' cable and connector.

Size: 7" dia., 16-1/2" ht.

Lamp: One 1.5 LED module included.



P5247-09



P5247-31



P5297-31

\*All LED Landscape lighting must be used with transformer P8270-31. Recommend using 14 gauge cable (P8716 or P8626).



P5298-31



P5225-31

**DOME PATH LIGHT**  
**P5225-31** Black\*  
Die cast aluminum construction.  
Includes stake and deck mount,  
4' cable and connector. 45° tilt-up.  
Size: 7" dia., 23" ht.  
Lamp: One 1.5w LED module  
included.

**PATH LIGHT**  
**P5298-31** Black\*  
Die cast aluminum construction.  
Includes stake and deck mount,  
4' cable and connector.  
Size: 6" dia., 17-1/2" ht.  
Lamp: One 1.5w LED module  
included.

LED Transformer



11

**P8270-31** Non metallic case protects  
timer controls and 120v to 12v  
transformer. Surge protected with  
grounded cord/plug set and easy  
12V cable attachment. Photocontrol  
triggers "time on", eliminating  
seasonal adjustment. 45w max.  
Non-dimmable. Recommend using  
14 gauge cable (P8716 or P8626).

Product	Watt	Description	Size (W X H X D)
P8270-31	45	45w LED	4" x 5-5/8" x 3-1/2"

# Path Lights

LIGHTING WALKWAYS, PATHS, STEPS AND DRIVEWAYS WILL WELCOME YOUR GUESTS AND HELP PREVENT UNWANTED ACCIDENTS. THE FIRST IMPRESSION OF A HOME OR BUSINESS IS THE ENTRYWAY, AND IT IS IMPORTANT THAT CARE BE TAKEN TO LIGHT IT PROPERLY.



P5275-31

## ASHMORE

**P5250-20** Antique Bronze

**P5250-31** Black

Water seeded glass. Cast aluminum construction.

Size: 6-1/2" W., 25-1/2" ht.

Lamp: One 12V T5 wedge base, 18w max. included.

## COPPER

**P5257-20** Antique Bronze

Path light with clear optic seeded glass. Solid brass construction.

Size: 7-3/4" dia., 26" ht., 10" depth

Lamp: One 12V T5 wedge base, 18w max. included.

## TIFFANY ART GLASS

**P5271-20** Antique Bronze

Green art glass shade suspended from detailed arm. Solid brass construction.

Size: 7" dia., 23" ht.

Lamp: One 12V T5 wedge base, 18w max. included.



P5257-20

## CRANBROOK

**P5276-71** Gilded Iron

Tiffany art glass

Size: 6-1/4" dia., 25" ht.

Lamp: One 12V T5 wedge base, 18w max. included.

## COVENTRY

**P5275-31** Black

Water seeded glass.

Size: 5-3/4" dia., 25" ht.

Lamp: One 12V T5 wedge base, 18w max. included.



P5250-20



P5250-31



P5276-71




P5271-20





P5273-46

**MISSION**

**P5261-46** Weathered Bronze  
Light honey art glass. Solid brass construction.  
Size: 6-1/2" sq., 19-3/8" ht.  
Lamp: One 12V T5 wedge base, 18w max. included. 




P5261-46


**MISSION**

**P5273-46** Weathered Bronze  
Light honey art glass. Solid brass construction. Square stem included with 1/2 NPS thread.  
Size: 6-1/2" sq., 30" ht.  
Lamp: One medium base lamp, 60w max. (line voltage)


*Shown: P5261-46 Path lights.***CAST ALUMINUM SHADE**

**P5253-20** Antique Bronze  
With wire guard and etched glass enclosure. Solid brass stem.  
Size: 6" W., 25" ht.,  
Lamp: One 12V T5 wedge base, 18w max. included. 

**ARRIVE**

**P5258-31** Black  
Textured water glass.  
Size: 5" W., 6-1/2" ht.  
Lamp: One 12V T5 wedge base, 18w max. included. 

**ARTS & CRAFTS**

**P5272-46** Weathered Bronze  
Light honey art glass panels. Solid brass construction.  
Size: 5-1/2" W., 28-3/4" ht., 6-1/2" depth  
Lamp: One 12V T5 wedge base, 18w max. included. 




P5272-46



P5258-31



P5253-20

All low voltage  fixtures include:  
1/2 NPS threaded adapter connector  
(P8651) mounting stake (P8618-31),  
and lamp. Must be connected to a  
12V transformer p. 642.

## Spread Lights



P5225-31

### LED DOME PATH LIGHT

**P5225-31** Black

Die cast aluminum construction. Includes stake and deck mount, 4' cable and connector. Use with P8270-31 transformer. 45° tilt-up. Size: 7" dia., 23" ht. Lamp: One 1.5w LED module included.



P5238-31WB

### SPREAD LIGHT

**P5238-31WB** Black

Cast aluminum construction. Twist off cover for easy relamping. Size: 6-1/2" dia., 11-1/2" ht. Lamp: One 12V halogen bi-pin, 20w max. included.



P5248-25WB

### ADJUSTABLE PATH/FLOOD

**P5248-25WB** Verde

Die cast aluminum construction with ribbed patterned top housing. Size: 4" W., 20" ht., Extends 7-7/8" Lamp: One 12-volt halogen bi-pin, 20w max. included.



P5265-31

### DOME

**P5265-31** Black

Cast aluminum construction. White innerlined shade for maximum light output. Size: 9" dia., 26-3/4" ht. Lamp: One medium base A-19 lamp, 100w max.

## Linear



P5246-31

### LINEAR PATH LIGHT

**P5246-31** Black

Linear path light with ground stake. Die cast aluminum construction with louvered glass. Use with P8270-31 transformer. Size: 5-3/8" W., 2-5/8" ht. Lamp: One 1.5w LED module included.



P5200-20

### LINEAR PATH LIGHT

**P5200-20** Antique Bronze

Cast solid bronze. Furnished with stake. Size: 7" W., 1-7/8" ht. Lamp: One 12-volt T5 wedge base, 18w max. included.

## Pagoda



P5204-38

### PAGODA

**P5204-38** Green

**P5204-31** Black  
Cast aluminum. Clear glass liner. 1/2 NPS threaded fitting for permanent or P5233 installation. Size: 6" dia., 7" ht. Lamp: One medium base lamp, 100w max.



P5219-31

### PAGODA

**P5219-31** Black

Cast aluminum. Clear glass liner. 1/2 NPS threaded fitting for P8667 or P8618 installation. Size: 6" dia., 7" ht. Lamp: One 12V T5 wedge base, 18w max included.

All low voltage fixtures include: 1/2 NPS threaded adapter connector (P8651) mounting stake (P8618-31), and lamp. Must be connected to a 12V transformer p. 642.



# Bollard

OPTIONAL POLE MOUNT OR  
MOUNT DIRECTLY ON GROUND

## P5205-31 Black

Etched glass. 1/2 NPS threaded fitting for permanent or P5233 installation. For Bollard mount order with P5313-31.

Size: 5" dia., 7-1/4" ht.

Lamp: One medium base lamp, 60w max.



P5205-31



P5205-31 with P5313-31 Pole

## Pole Mount Options

Mount P5205-31 on top of bollard to spread wider circles of light and to coordinate ground lights with bollards. Aluminum construction with pedestal and "J" bolts for surface mounting on paved areas or atop walls. For complete unit order bollard accessory and light.



## P5233-31 Black

7" Cast aluminum spike for portable installation. 15' SJT #18 cord with plug. Accommodates 1/2 NPS threaded fitting.



## P5313-31 Black

Bollard Pole for P5205-31. (order each separately). Size: 4-3/4" dia., 28-3/8" ht. Accepts P5205-31 only.

# Pagoda

OPTIONAL POLE MOUNT OR  
MOUNT DIRECTLY ON GROUND

## LARGE PAGODA

### P5210-31 Black

Cast aluminum path and driveway light. Clear glass liner. 1/2 NPS threaded fitting for permanent or P5233 installation. For Bollard mount order with P5312-31 pole.

Size: 10" dia., 9-1/2" ht.

Lamp: One medium base lamp, 100w max.



P5210-31



P5210-31 with P5312-31 Pole

## Pole Mount Options

Mount P5210-31 on top of bollard to spread wider circles of light and to coordinate ground lights with bollards. Aluminum construction with pedestal and "J" bolts for surface mounting on paved areas or atop walls. For complete unit order bollard accessory and light.



## P5233-31 Black

7" Cast aluminum spike for portable installation. 15' SJT #18 cord with plug. Accommodates 1/2 NPS threaded fitting.



## P5312-31 Black

Bollard Pole for P5210-31. (order each separately). Size: 3-7/8" dia., 28-3/8" ht.



## Well Lights




**P5295-31 Black**  
Die cast aluminum, glass cover. Includes 4' cable and connector. Size: 5" dia., 4" ht. Lamp: One 3w LED module included. Use with P8270-31 transformer.


PROGRESS **LED**



**P5229-31**  
shown with optional P8613-31  
and optional P8684-68

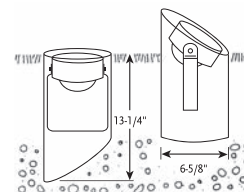


**P5229-31 Black**  
Adjustable well light. Well sleeve is 1/4" thick PVC pipe and installs flush or reversed provides lamp shielding. Inconspicuous "up light" which adjusts to 45° from its concealed in-ground installation. (Requires external transformer.)

Size: 6-5/8" dia., 13-1/4" ht.  
Lamp: One 12-volt PAR-36, 50w max. 


**Note: Glass cover and cube cell louver need to be ordered separately**

**P8613-31 Black**  
Cube cell louver for glare control for P5229-31.

**P8684-68 Clear**  
Tempered glass cover for added lamp protection for P5229-31.

All low voltage  fixtures include: 1/2 NPS threaded adapter connector (P8651) mounting stake (P8618-31), and lamp. Must be connected to a 12V transformer p. 642.



**P5228-31 Black**  
Cast aluminum adjustable well light. Clear glass lens. Twist off cover for easy relamping. Internal gimbal ring adjusts 45° max. Size: 3-1/2" dia., 8-1/2" ht. Lamp: One 12-volt MR-16, 50w max. 

## Flood Lights LINE VOLTAGE

### P5234-31 Black

Black powder-coat painted aluminum resists chipping and fading. Clear lens. Locking vertical adjustment. Size: 4-1/2" dia., 6-5/8" long. Lamp: One PAR 20, 50w max.

### P5235-31 Black\*

Black powder-coat painted aluminum resists chipping and fading. Clear lens. Locking vertical adjustment. Size: 5-1/4" dia., 8-1/4" long. Lamp: One PAR 38, 150w max.

### P5241-31 Black

Black powder-coat painted cast aluminum resists chipping and fading. Clear lens. Locking vertical adjustment. Size: 4-3/4" dia., 6-5/8" long. Lamp: One PAR 30, 75w max.



P5234-31




P5235-31




P5241-31

## Flood Lights LOW VOLTAGE


### P5230-31 Black

Miniature low voltage spot light. Black powder coat finish over die cast aluminum. Locking vertical adjustment. Mounting stake included. Size: 3" dia., 5" long. Lamp: One 12V MR16, 50w max. 

### P5237-31 Black\*


Black powder-coat painted aluminum resists chipping and fading. Locking vertical adjustment. Size: 5-1/4" dia., 5-1/4" length. Lamp: One 12V PAR-36, 50w max. 

### P5239-31WB Black

Adjustable hinge door for easy relamping. Includes stake. Size: 5-1/4" W., 6" ht., 3-1/2" depth. Lamp: One 12V halogen bi-pin lamp. 50w max included. 

### P5279-25 Verde

### P5279-31 Black

12V composite accent light. Non-metallic construction and stainless hardware prevent corrosion. Size: 4-1/4" dia., 8-3/4" ht. Lamp: One MR16, GU5.3 base, 50w max. 

### P5299-31 Black

Adjustable knuckle for aiming. Die cast aluminum. Stake and deck mount, 4' cable and connector included. Size: 4-1/2" dia., 6-5/8" ht. Lamp: One 3w LED module included. Use with P8270-31 transformer.

PROGRESS 



P5299-31



P5239-31WB



P5279-25



P5237-31



P5230-31

\* See page 643 for flood light accent accessories.



# Specialty, Deck and Rail Lights



## P5224-31WB Black

Durable cast aluminum is powder-coat painted for superior resistance to chipping, fading and the effects of salt air.

Size: 3" W., 1-3/4" ht., extends 1-3/8"

Lamp: One T5 wedge base, 13w max. included.



P5224-31WB



## P5223-31WB Black

## P5223-54WB Natural

Durable cast aluminum. Black finish is powder-coat painted to resist chipping, fading and the effects of salt air.

Size: 3-1/8" W., 2" ht., extends 1-3/8"

Lamp: One T5 wedge base, 13w max. included #912.



P5223-31WB



P5223-54WB



## P5296-31 Black

PROGRESS LED

Die cast aluminum with black powder-coat finish. Polycarbonate diffuser. 12v AC input.

Use with LED transformer P8270-31.

Size: 4" dia., 2" ht., extends 3"

Lamp: 3 1.5w LED modules included.



P5296-31



## MISSION

## P5262-46 Weathered Bronze

Rail mount or post lantern.

Fits 4" x 4" post or flush mount.

Size: 6-1/2" W., 7-1/2" ht.

Lamp: One T5 wedge base, 18w max. included.



# LED Step Lights

4W 3000K COLOR TEMPERATURE WITH 84+ CRI AND A 120° BEAM SPREAD. LED STEP/WALL LIGHTS ARE AVAILABLE IN A VERTICAL OR HORIZONTAL CONFIGURATION FOR MOUNTING INTO A SINGLE-GANG WALLBOX.

**P6827-0930K** Brushed Nickel  
**P6827-3030K** White  
 Louvered horizontal step/wall light.  
 Wet location listed.  
 Size: 5-1/4" W., 3-1/2" ht.  
 Lamp: 4w LED module included.



**P6828-0930K** Brushed Nickel  
**P6828-3030K** White  
 Louvered vertical step/wall light.  
 Wet location listed.  
 Size: 3-1/2" W., 5-1/4" ht.  
 Lamp: 4w LED module included.

**P6829-0930K** Brushed Nickel  
**P6829-2030K** Antique Bronze  
**P6829-3030K** White  
**P6829-3130K** Black  
 Horizontal step/wall light. Wet location listed.  
 Size: 2-7/8" W., 4-1/2" ht.  
 Lamp: 4w LED module included.



**P6832-0930K** Brushed Nickel  
**P6832-2030K** Antique Bronze  
**P6832-3030K** White  
**P6832-3130K** Black  
 Vertical step/wall light. Wet location listed.  
 Size: 2-7/8" ht., 4-1/2" W.  
 Lamp: 4w LED module included.




## Step Lights




P6802-31, P6803-31



P6803-30

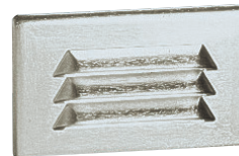


P6817-16

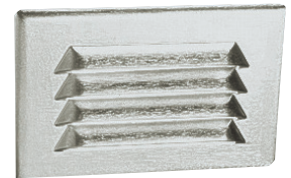


P6819-16


**P6802-31** Black  
 Cast aluminum housing with black aluminum louver. For wood, brick, masonry, and poured concrete installations. IC Rated.  
 Size: Refer to diagram.  
 Lamp: One 7w 2-pin twin compact fluorescent lamp, G23 base.

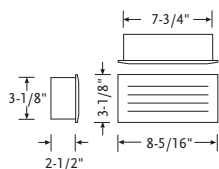


**P6803-31** Black  
**P6803-30** White  
 Cast aluminum housing with metal louver. For wood, brick, masonry, and poured concrete installations. With Therma-Gard protection.  
 Size: Refer to diagram.  
 Lamp: One 25w 120V T6-1/2, intermediate base.

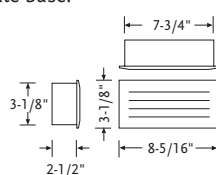

**P6817-16** Satin Aluminum  
**P6817-31** Black  
 Cast aluminum, tempered glass with louver faceplate. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations.  
 Size: Refer to diagram.  
 Lamp: One medium base; 25w max.

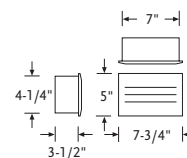

**P6819-16** Satin Aluminum  
 Cast aluminum, tempered glass with louver faceplate. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations.  
 Size: Refer to diagram.  
 Lamp: One medium base; 75w max.

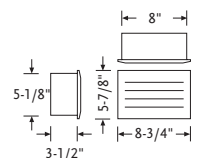



# Transformers

## Plug-in Compatible Transformers



- Multiple secondary taps of 12, 13 and 15 volts allow maximum light output and lamp life for long or short runs and loading variations (300, 600 and 900 watt units only)
- Three foot 12 gauge cord with grounding plug
- Thermal protection in the primary circuit to avoid overheating
- Resettable circuit breakers in secondary circuits for electrical safety and convenience
- Weatherproof construction, powder-coat painted (P8590-31, P8591-31, P8592-31, P8522-31 and P8523-31)
- Stainless steel construction (P8519-01, P8520-01 and P8521-01)
- Easy open enclosure with KO's for hardwiring and photocell installation
- Easy wire terminal board for secondary connections
- For outdoor use
- Plug in timer and photocell compatible (see page 603)

Product	Watt	Description	Size (W x H x D)
<b>P8519-01</b>	300	300w stainless steel	5-3/8" x 17" x 5-3/8"
<b>P8520-01</b>	600	(2) 300w circuits, stainless steel	6-5/8" x 17" x 5-5/8"
<b>P8521-01</b>	900	(3) 300w circuits, stainless steel	6-5/8" x 19" x 5-7/8"
<b>P8522-31</b>	300	300w	5" x 17" x 5-5/8"
<b>P8523-31</b>	600	(2) 300w circuits	5" x 17" x 5-5/8"

## Manual Transformers



### P8590-31, P8591-31, P8592-31

- These transformers have all the features shown above except plug-in capability.
- Powder coated for outdoor use
- Magnetic

Product	Watt	Description	Size (W X H X D)
<b>P8590-31</b>	150	150w manual	3-1/2" x 8-3/4" x 3"
<b>P8591-31</b>	300	300w manual	4" x 10" x 5"
<b>P8592-31</b>	600	(2) 300w circuits manual	4" x 12" x 4-1/2"

## Electronic Transformers



P8517-31

**P8517-31** supplied with integral photo-cell. Non-metallic housing to prevent corrosion. Three foot 18-gauge cord with grounding plug. Suitable for outdoor installation only.



P8518-31

**P8518-31** supplied with remote mount photo-cell with auto setting and 2 hr., 6 hr., and 8 hr. shut off settings. Suitable for outdoor installation only.

Product	Watt	Description	Size (W X H X D)
<b>P8517-31</b>	150	150w electronic	3-5/8" x 6-1/2" x 2-3/8"
<b>P8518-31</b>	300	300w electronic	5-1/8" x 7-1/4" x 3"

## LED Transformer



11

**P8270-31** Non metallic case protects timer controls and 120v to 12v transformer. Surge protected with grounded cord/plug set and easy 12V cable attachment. Photocontrol triggers "time on", eliminating seasonal adjustment. 45w max. Non-dimmable. Recommend using 14 gauge cable (P8716 or P8626).

Product	Watt	Description	Size (W X H X D)
<b>P8270-31</b>	45	45w LED	4" x 5-5/8" x 3-1/2"

# Landscape Accessories

## Installation Accessories



**P8651-01** Black  
Low voltage Quick-connector.  
Allows #10 or #12 gauge outdoor  
low voltage cable to connect to an  
18 gauge wire from fixture.  
Size: 1-5/8" W., 5/8" ht.



**P8671-31** Black  
Polycarbonate canopy for tree trunks  
and walls. 1/2 NPS thread.  
Size: 4-1/8" dia. Extends 1-3/16".



**P8672-31** Black  
Miniature pedestal mount. Powder-  
coat painted cast metal. Flanged base  
for surface mounting. 1/2 NPS thread.  
Size: 1-1/2" dia., 1" ht.



**P8708-01** Silicone filled  
underground direct burial wire  
connector. #20-#10 gauge.  
10 per pack (1 standard pack =  
10 pieces).  
Size: 1-3/4" L., 5/8" dia.



Mounting Stems 1/2 NPS threads  
16" stem **P8666-31** Black  
**P8666-38** Green  
8-1/2" stem **P8667-31** Black  
**P8667-38** Green



12-Volt Cable, 2 conductor. UL listed.

**P8635-31** Black 10-gauge 300 ft.

**P8628-31** Black 12-gauge 100 ft.

**P8699-31** Black 12-gauge 200 ft.



**P8617-31** Black 14-gauge 75 ft.

**P8626-31** Black 14-gauge 150 ft.

Recommended for use with P8270-31 transformer and LED Lighting. Low voltage #14 cable runs from P8270-31 control center down path of lighting. UV protected, burial is not required, hide with mulch if desired. Perfect fit with fixture connectors for easy installation (150' is the max. run distance from transformer location to assure best fixture operation). Available in 75', P8617-31 and 150' lengths, P8626-31.



**P8618-31** Black  
Ground stake, 8-3/4" ABS movable stake  
for direct mounting of 12v landscape lights.  
1/2 NPS thread.



**P8562-31** Black  
Quick-mount landscape post for 120v or 12v PVC.  
Size: 3" dia., 20" length with stabilizing grid and  
post, 1/2 NPS threaded hole. Wet location listed.

## Plug-in Compatible Transformer Accessories



**P8524-01** Two-prong plug-in timer.  
Allows multiple settings. (To be used  
with plug-in compatible transformers.)  
Size: 2-3/4" W., 3-1/4" ht. (see page 602)



**P8531-01** Digital timer.  
Size: 3"W., 4-1/8" ht, extends 1-5/8"  
Allows multiple settings. (To be used  
with plug-in compatible transformers.)  
(see page 602)



**P8525-31** Direct mount photo-cell.  
Turns transformer on at dusk and off when ambient light  
appears. (To be used with plug-in compatible transformers.)  
(see page 602) Size: 1-3/8" dia., 3-3/4" length.



**P8526-31** Remote mount photo-cell.  
Turns on transformer at dusk and off when ambient light  
appears. Includes 10 ft. of cord. (To be used with plug-in  
compatible transformers.) (see page 602)  
Photocell Size: 1-3/8" dia., 5-1/4" length

## Flood/Accent Light Accessories



**P8613-31** Black  
45° cube cell louver fits under  
supplied glass lens.  
Size: 4-3/4" cube cell for P5235-  
31 & P5237-31



**P8614-31** Black  
Light shields adjust to desired  
length on cowling of light  
fixture. Rotate bias-cut end to  
adjust cutoff angle.  
Size: 7-1/4" long for P5235-31  
& P5237-31



**P7801-01** Lamp  
18w T5 wedge base lamp





RECESSED LIGHTING PLAYS A KEY ROLE IN THE FUNCTIONALITY AND DESIGN OF YOUR LIVING SPACE. CONSIDER PAIRING RECESSED FIXTURES WITH OTHER DECORATIVE SOURCES LIKE PENDANTS, CHANDELIERS AND SCONCES TO ACCOUNT FOR GENERAL, AMBIENT AND TASK ILLUMINATION.

ADDITIONALLY, WITH ADVANCEMENTS IN LIGHTING TECHNOLOGY, IT'S SIMPLE TO REDUCE ENERGY COSTS AND CONSUMPTION IN YOUR HOME BY REPLACING RECESSED FIXTURES WITH LED VERSIONS.






The LED flush mount series uses an intuitive snap-in system that makes flush mount installation easier than ever.

Simply, install adapter onto junction box, then snap into place using the flush mount clip.

- Flicker free dimming with many ELV dimmers
- Wet location listed
- 90+ CRI
- 120v input voltage AC
- 63/Lumens per watt
- 42,000 hour life
- 17w: 1050 Lumens
- 63/Lumens per watt
- 12w: 630 Lumens
- 52.5/Lumens per watt
- CA Title 24 Compliant

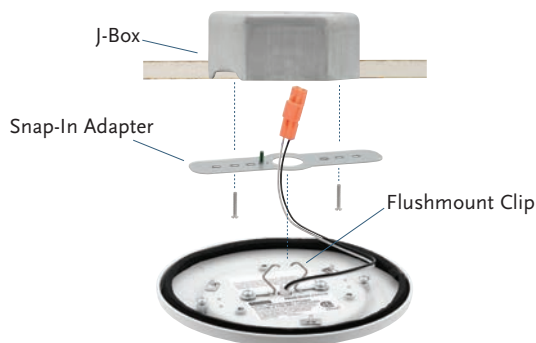

## FLUSH MOUNT/RECESSED MOUNT

### 7-1/4" ROUND

**P8022-20/30K9-AC1-L10** Antique Bronze  
**P8022-28/30K9-AC1-L10** White  
**P8022-31/30K9-AC1-L10** Black  
**P8022-82/30K9-AC1-L10** Metallic Gray  
 7-1/4" Round flush mount/recessed  
 Size: 7-1/4" dia., 1-1/4" ht.  
 Lamp: One integral 17w LED module included.



P8022-20/30K9-AC1-L10



P8022-28/30K9-AC1-L10



P8022-31/30K9-AC1-L10



P8022-82/30K9-AC1-L10

### 7-1/4" SQUARE

**P8027-20/30K9-AC1-L10** Antique Bronze  
**P8027-28/30K9-AC1-L10** White  
**P8027-31/30K9-AC1-L10** Black  
**P8027-82/30K9-AC1-L10** Metallic Gray  
 7-1/4" Square flush mount/recessed  
 Size: 7-1/4" dia., 1-1/4" ht.  
 Lamp: One integral 17w LED module included.



P8027-20/30K9-AC1-L10



P8027-28/30K9-AC1-L10




P8027-31/30K9-AC1-L10



P8027-82/30K9-AC1-L10

## RECESSED INSTALLATION HARDWARE

Included adjustable mounting option that fits 6", 5" or 4" recessed housing. The fixture also includes an E26 Edison Base adapter for a retrofit screw-in option. This hardware is included in P8022 and P8027 series.

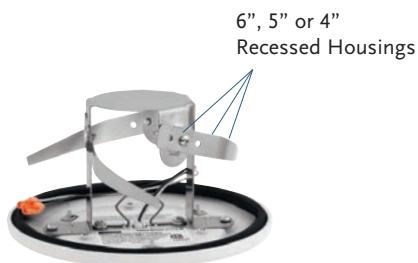

E26 Edison Base Adapter





## FLUSH MOUNT

**P8222-28/30K9-AC1-L10** White  
Same as the P8022-28/30K9-AC1-L10 except it can be used in junction box installation only. Recessed hardware is not included.



P8222-28/30K9-AC1-L10



**P8595-01**

Hardware for P8222 to make it available for recessed installation. Mounting option fits 6", 5" or 4" recessed housings. Edison base adapter included. Size: 5-3/16" w, 3-9/16" ht.

## FLUSH MOUNT

### 5-1/2" ROUND

**P8240-20/30K9-AC1-L06** Antique Bronze  
**P8240-28/30K9-AC1-L06** White  
**P8240-31/30K9-AC1-L06** Black  
**P8240-82/30K9-AC1-L06** Metallic Gray  
5-1/2" Round flushmount  
Size: 5-1/2" dia., 1-1/2" ht.  
Lamp: One integral 12w LED module included.



P8240-20/30K9-AC1-L06



P8240-28/30K9-AC1-L06



P8240-31/30K9-AC1-L06



P8240-82/30K9-AC1-L06

### 5-1/2" SQUARE

**P8241-20/30K9-AC1-L06** Antique Bronze  
**P8241-28/30K9-AC1-L06** White  
**P8241-31/30K9-AC1-L06** Black  
**P8241-82/30K9-AC1-L06** Metallic Gray  
5-1/2" Square flushmount  
Size: 5-1/2" sq., 1-1/2" ht.  
Lamp: One integral 12w LED module included.



P8241-20/30K9-AC1-L06



P8241-28/30K9-AC1-L06



P8241-31/30K9-AC1-L06

### 5-1/2" DECORATIVE ROUND

**P8247-20/30K9-AC1-L06** Antique Bronze  
**P8247-28/30K9-AC1-L06** White  
**P8247-31/30K9-AC1-L06** Black  
**P8247-09/30K9-AC1-L06** Brushed Nickel  
Round with etched glass  
Size: 5-1/2" round, 1-1/2" ht.  
Lamp: One integral 12w LED module included.



P8247-20/30K9-AC1-L06



P8247-28/30K9-AC1-L06



**P8596-01**

Recessed mounting accessory for P8240/8241 and 8247 series. Allows for installation in 4" housings. Edison base adapter included.

## 6" LED RECESSED NEW CONSTRUCTION AND REMODEL

New Construction  
Air-Tight IC and Non-IC

**P87-LED**

Ceiling opening: 6-7/8" dia.  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" & 3/4"

- Integral quick connect mates with P8071 series LED trims.



## 6" NEW CONSTRUCTION OR REMODEL LED TRIM

800 Lumens



**P8071-28/30K9-AC1-L08** 

**Features**

- Frosted polycarbonate lens controls direct glare from the LEDs
- Dimmable to 15%
- 13-watt input power
- Lumen output 825 lumens
- Lumen output and distribution comparable to a 65w BR30 incandescent lamp
- CRI is 90+ rivaling CFL
- 42,000 hours life based on 70% lumen maintenance (TM-21)
- Suitable for use in IC or NON-IC applications
- CSAus listed for wet locations



Includes Edison base socket and Quick-Link connector



**P8071-20/30K9-AC1-L08**



**P8071-31/30K9-AC1-L08**



**P8071-82/30K9-AC1-L08**

1000 Lumens



**P8071-28/30K-L10 STR2 White**  
1000 lumen 3000K

**P8071-28/35K-L10 STR2 White**  
1000 lumen 3500K


**Features**

- Frosted polycarbonate lens controls direct glare from the LEDs
- Dimmable to 10%
- 12-watt input power
- Lumen output 1037 lumens
- Lumen output and distribution comparable to a 75w PAR30 incandescent lamp
- CRI is 80+ rivaling CFL
- 60,000 hours life based on 70% lumen maintenance (TM-21)
- Suitable for use in IC or NON-IC applications
- Available in 3000K and 3500K color temperatures
- cULus listed for wet locations



Includes Edison base socket and Quick-Link connector

## 4" LED RECESSED NEW CONSTRUCTION AND REMODEL

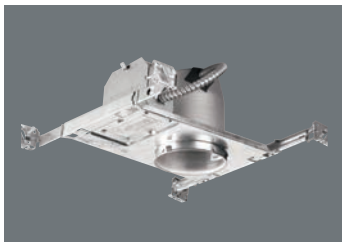


### P831-LED

Ceiling opening: 4-1/2"  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-1/2"

### P831-LED

- Integral quick link connector mates with P8080 series LED trims

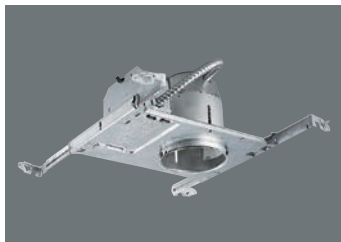

### P830-LED

Ceiling opening: 4-1/2"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2" and 3/4"

### P830-LED

- Integral quick link connector mates with P8080 series LED trims



### P832-LED

Ceiling opening: 4-1/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2"

### P832-LED

- Retrofit version of P830-TG for use in existing ceilings

## 4" P8080 NEW CONSTRUCTION OR REMODEL



Includes Edison base socket and Quick-Link connector

### Features

- LED (Light Emitting Diode) lamp included
- 10-watt input power
- Lumen output 620 lumens
- Lumen output and distribution comparable to 50w R20 incandescent lamp
- CRI is 90+
- 42,000 hours life based on 70% lumen maintenance (TM-21)
- Suitable for use in IC or NON-IC applications
- cULus listed for wet locations



P8080-28/30K9-AC1-L06



P8080-20/30K9-AC1-L06



P8080-31/30K9-AC1-L06



P8080-82/30K9-AC1-L06



## 5" P8061 NEW CONSTRUCTION OR REMODEL (TRIM ONLY)



P8061-20/30K9-AC-L08 Antique Bronze  
P8061-28/30K9-AC-L08 White  
P8061-31/30K9-AC-L08 Black  
P8061-82/30K9-AC-L08 Metallic Gray

### Features

- LED (Light Emitting Diode) lamp included
- 13-watt input power
- Lumen output 800 lumens
- Lumen output and distribution comparable to 65w BR30 incandescent lamp
- CRI is 70+ rivaling CFL
- 42,000 hours life based on 70% lumen maintenance (TM-21)
- Suitable for use in IC or NON-IC applications
- cULus listed for wet locations



Includes Edison base socket and Quick-Link connector

# 6" INCANDESCENT

## IC, NON-IC, AIR-TIGHT UNIVERSAL HOUSINGS

For insulated or non-insulated ceilings. 7-3/4" outside diameter (OD), except where indicated.

### New Construction Air-Tight IC and Non-IC



**P87-AT**  
Ceiling opening: 6-7/8" dia.  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" & 3/4"

- P87-AT**
- Can be installed in ceilings from 1/2" to 2-1/2" thick
- Meets Washington State Energy Code requirements
- UL & CUL listed for damp locations and through wiring
- Integral Romex clamp
- Tool-less can adjustment for varying ceiling thickness
- Slotted, interlocking bar hangers securely span 24" T-bar spacing
- Full reflector design eliminates light leaks
- Rated for 8 #12 90° conductors (4 in/4 out)
- US Patent #5758959, 5857766, 6004011

### Remodel IC and Non-IC



**P187-TG**  
Ceiling opening: 6-5/8" dia.  
Recessed depth: 7-1/2"  
Pryouts: 1/2"

- P187-TG**
- Retrofit version of the P87-AT
- Exclusive mounting slide bars permit quick and solid mounting in ceilings
- Can be installed in ceilings from 1/2" to 1-1/2" thick
- IC/Non-IC peel away label for field conversion
- UL and CUL listed for damp locations and through wiring
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end-of-run applications
- US Patent #5758959

### New Construction Air-Tight IC and Non-IC



**P87-ATQC**  
Ceiling opening: 6-7/8" dia.  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" & 3/4"

- P87-ATQC**
- Quick-connects allow simple installation of 12-20 AWG wire, without the need for wire nuts
- Can be installed in ceilings from 1/2" to 2-1/2" thick
- Meets Washington State Energy Code requirements
- UL & CUL listed for damp locations and through wiring
- Integral Romex clamp
- Tool-less can adjustment for varying ceiling thickness
- Slotted, interlocking bar hangers securely span 24" T-bar spacing
- Full reflector design eliminates light leaks
- Rated for 8 #12 90° conductors (4 in/4 out)
- US Patent #5758959, 5857766, 6004011



Quick-connect

## NON-IC TRIMS

Insulation must be 3" from housing. 7-3/4" outside dia.

### Pin Hole



**P8065-28** White  
w/ Black Baffle  
Lamp: 75w PAR16, 40w  
R16, 50w R20/PAR20/  
PAR30, 40w A19

### Wall Washer



**P8052-28** White Baffle  
Lamp: 60w A19

### Fresnel Wet location listed



**P8062-28** White  
Metal flange  
Lamp: 60w A19,  
75w PAR 30 Short Neck

### Albalite Glass Wet location listed



**P8060-28** White  
Metal flange  
Lamp: 60w A19,  
75w PAR 30 Short Neck

### Albalite Glass Wet location listed



**P8008-60** White  
Non-metallic flange  
Lamp: 60w A19, 75w PAR 30  
Short Neck

## IC TRIMS & NON-IC TRIMS

For insulated or non-insulated ceilings, 7-3/4" outside diameter (OD), except where indicated.

### Step Baffle



**P8066-28** White  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR40,  
40w A19

### Step Baffle



**P8066-09** Brushed Nickel  
Unpainted flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR40,  
40w A19

### Step Baffle



**P8066-20** Antique Bronze  
Unpainted flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR40,  
40w A19

### Step Baffle



**P8066-31** Black  
White flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR40,  
40w A19

### Step Baffle



**P8082-31** Black  
**P8082-28** White  
OD: 8-3/4"  
IC Lamp: 90w PAR 38,  
BR40  
Non-IC Lamp:  
150w PAR38, 120w BR40

### Long Neck Baffle



**P8075-28** White  
**P8075-31** Black  
IC Lamp: 65w BR30  
75w PAR30 long neck  
Non-IC Lamp: 100w A19,  
75w PAR 30 Long Neck,  
85w BR 30

### Eyeball

Rotates 358°, tilts 30° max.



**P8076-20** Antique  
Bronze  
IC/Non-IC Lamp:  
75w PAR 30, 65w BR30

### Eyeball

Rotates 358°, tilts 30° max.



**P8076-09** Brushed Nickel  
**P8076-28** White  
IC/Non-IC Lamp:  
75w PAR 30, 65w BR30

### Baffled Mini Eyeball

Rotates 358°, tilts 30° max.



**P8077-28** White Baffle  
IC/Non-IC Lamp:  
75w R20, PAR 20

### Regressed Baffled Eyeball

Rotates 358°, tilts 30° max.



**P8079-28** White Baffle  
IC Lamp: 65w BR30,  
50w PAR 30  
Non-IC Lamp: 75w  
PAR 30, 85w BR 30

### Regressed Baffled Eyeball

Rotates 358°, tilts 30° max.



**P8079-31** Black Baffle  
IC Lamp: 65w BR30,  
50w PAR 30  
Non-IC Lamp: 75w  
PAR 30, 85w BR 30

### Regressed Mini Eyeball

Rotates 358°, tilts 30° max.



**P8078-28** White  
IC/Non-IC Lamp:  
75w R 20, PAR 20

### Open



**P8074-28** White  
OD: 8-3/4"  
IC Lamp: 90w BR40/  
PAR 38  
Non-IC Lamp: 150w  
PAR 38, 120w BR40

### Open Splay



**P8072-28** White  
IC Lamp: 75w PAR 30  
Long Neck, 65w BR 30  
Non-IC Lamp: 75w  
PAR30 Long Neck,  
100w A19, 85w BR 30

### Cones



**P8068-21A** ClearAlzak®  
White flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR 40,  
40w A19

### Cones



**P8068-28** White  
White flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR 40,  
40w A19

### Cones



**P8068-22A** Gold Alzak®  
White flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR 40,  
40w A19

### Cones



**P8053-31** Black Alzak®  
Black flange  
IC Lamp: 75w PAR 30,  
65w BR30  
Non-IC Lamp: 150w  
PAR 38, 120w BR 40,  
40w A19

### Drop Opal Shower

Wet location listed



**P8007-60** White  
Metal flange  
OD: 8-1/4"  
IC Lamp: 60w A19,  
50w PAR30  
Non-IC Lamp: 100w A19,  
75w PAR 30

### Drop Opal Shower

Wet location listed



**P8009-60** White Glass  
Non-metallic flange  
IC Lamp: 40w A19,  
50w PAR 30  
Non-IC Lamp: 75w A19,  
75w PAR 30

### Dome Shower

Wet location listed



**P8025-60** White  
Polycarbonate  
OD: 8-3/4"  
IC Lamp: 40w A 19  
Non-IC Lamp: 75w A19

### Open Shower

Wet location listed



**P8072WL-28\*** White  
Metal flange  
IC/Non-IC Lamp:  
50w PAR 30 Long Neck

### Open Shower

Wet location listed



**P8074WL-28** White  
Metal flange  
OD: 8-3/4"  
IC/Non-IC Lamp: 75w  
PAR 38\*

### Fresnel Shower

Wet location listed



**P8011-60** White  
Non-metallic flange  
IC Lamp: 50w PAR  
30 SN  
Non-IC Lamp:  
75w PAR 30 Short Neck

\* WL trims require use with outdoor rated PAR lamps



# 6" INCANDESCENT

## HIGH WATTAGE IC HOUSINGS & TRIMS

For insulated ceilings. IC trims may be used as non-IC trims with same wattages. 7-3/4" outside diameter (OD), except where indicated.

### New Construction or Top Accessible Ceilings Air-Tight IC



**P821-AT**

Ceiling opening: 6-7/8" dia.  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-5/8"  
Pryouts 1/2" and 3/4"

#### P821-AT

- Allows for high wattage in insulated ceilings up to 150w
- Meets Washington State Energy Code requirements
- Can be installed in ceilings from 1/2" to 2-1/2" thick
- UL and CUL listed for damp locations and through wiring
- Socket mounts to trim for consistent lamp position
- Spans 24" T-bar spacing
- Integral Romex clamp
- Integral nailer and T-bar mounting clamp
- Rated for 8 #12 90° conductors (4 in/4 out)
- US Patent #5758959, 5857766, 6004001

#### Open Splay



**P8072-28** White  
Lamp: 85w BR30, 75w PAR 30 Long Neck, 75w A19

#### Drop Opal Shower

Wet location listed



**P8007-60** White  
Metal flange, OD: 8-1/4" dia.  
Lamp: 75w A19, 75w PAR 30

#### Step Baffle



**P8075-28** White  
**P8075-31** Black  
Lamp: 85w BR30, 75w PAR30 Long Neck, 75w A19

#### Step Baffle



**P8082-28** White  
**P8082-31** Black  
OD: 8-3/4"  
Lamp: 120w BR40, 150w PAR 38

#### Eyeball

Rotates 358°, tilts 30° max.



**P8076-09** Brushed Nickel  
**P8076-20** Antique Bronze  
**P8076-28** White  
Lamp: 85w BR30, 75w PAR 30

#### Open



**P8074-28** White  
OD: 8-3/4"  
Lamp: 120w BR40, 150w PAR 38

#### Drop Opal Shower

Wet location listed



**P8009-60** White glass  
Non-metallic flange  
Lamp: 60w A19, 75w PAR 30

#### Step Baffle



**P8066-20** Antique Bronze  
Lamp: 120w BR40, 150w PAR 38, 100w A19

#### Cones



**P8053-31** Black Alzak®  
Black Flange  
Lamp: 150w PAR 38, 120w BR 40, 100w A19

#### Baffled Eyeball

Rotates 358°, tilts 30° max.



**P8079-28** White Baffle  
**P8079-31** Black Baffle and Black Eyeball  
Lamp: 85w BR30, 75w PAR 30

#### Fresnel

Wet location listed



**P8062-28** White  
Metal flange  
Lamp: 40w A19

#### Open Shower Trims

Wet location listed



**P8072WL-28** White  
Metal flange  
Lamp: 50w PAR 30 Long Neck  
**P8074WL-28** White  
OD: 8-3/4"  
Lamp: 75w PAR 38\*

#### Step Baffle



**P8066-09** Brushed Nickel\*  
**P8066-31** Black  
Lamp: 120w BR40, 150w PAR 38, 100w A19  
\*Unpainted flange

#### Cones



**P8068-22A** Gold Alzak®  
**P8068-21A** Clear Alzak®  
**P8068-28** White  
White Flange  
Lamp: 120w BR 40, 150w PAR 38, 100w A19

#### Baffled Mini Eyeball

Rotates 358°, tilts 30° max.



**P8077-28** White Baffle  
Lamp: 75w R20, PAR 16, PAR 20

#### Albalite

Wet location listed



**P8060-28** White  
Metal Flange  
Lamp: 40w A19

#### Dome Shower

Wet location listed



**P8025-60** White  
Polycarbonate  
8-3/4" outside diameter  
Lamp: 60w A19

#### Step Baffle



**P8066-28** White  
Lamp: 120w BR40, 150w PAR 38, 100w A19

#### Wall Washer



**P8052-28** White Baffle  
Lamp: 40w A19

#### Regressed Mini Eyeball

Rotates 358°, tilts 30° max.



**P8078-28** White  
Lamp: 75w R 20, PAR 16, PAR 20

#### Fresnel

Wet location listed



**P8011-60**  
Non-metallic flange  
Lamp: 75w PAR30 Short Neck

*Lamp wattages shown are maximum.*

*For accessories see page 680.*

*\* WL trims require use with outdoor rated PAR lamps*

## SHALLOW HOUSINGS & TRIMS

Insulation must be 3" from housing. 7-3/4" outside diameter (OD), except where indicated.

### NON-IC TRIMS

Wet location listed



**P8020-28** White  
Metal flange  
Lamp: 60w A19

Wet location listed




**P8010-60** White glass  
Non-metallic flange  
Lamp: 60w A19

Wet location listed



**P8028-60** White  
Polycarbonate  
8-3/4" outside diameter  
Lamp: 75w A19

New Construction IC and Non-IC

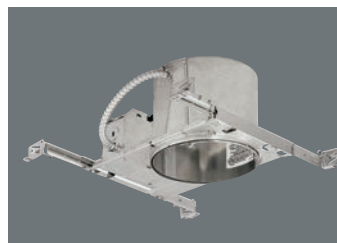

**P86-TG**  
Ceiling opening: 6-7/8" dia.  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 5-1/2"  
Pryouts 1/2" and 3/4"

Remodel IC and Non-IC



**P186-TG**  
Ceiling opening: 6-5/8" dia.  
Recessed depth: 5-1/2"  
Pryouts 1/2"

### IC TRIMS

Step Baffle



**P8063-28** White  
**P8063-31** Black  
Lamp: 75w PAR30,  
65w BR30

Open Trim



**P8073-28** White  
Lamp: 75w PAR30 Long  
Neck, 65w BR30

Eyeball



**P6676-29** White  
Lamp: 75w PAR30,  
65w BR30

Rotates 358°, tilts 30° max.

**Regressed Mini Eyeball**  
Rotates 358°, tilts 30° max.



**P6678-29** White  
Lamp: 50w PAR20, R20

**Open Shower Trim**  
Wet location listed



**P8073WL-28** White  
Metal flange  
Lamp: 50w PAR30\*

**P86-TG**

- Integral Romex clamp
- Designed for shallow plenums and 2"x 6" construction
- UL and CUL listed for damp locations and through wiring
- Can be installed in ceilings from 1/2" to 1-1/2" thick
- Integral nailer and T-bar mounting clamp
- Rated for 8 #12 90° conductors (4 in/4 out)
- Integral bar hanger

\* P86-TG and P186-TG can be converted to Air-Tight in the field with P8593-01 Gasket Kit

**P186-TG**

- Retrofit version of P86-TG
- For use in existing ceilings
- Integral flange on housing
- Exclusive locking bars permit quick mounting in ceilings 1/2" to 1" thick
- UL and CUL listed for damp locations and through wiring
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end-of-run applications



# 6" SLOPED CEILING

## HOUSINGS & TRIMS

### 6" 45° IC SLOPED CEILING HOUSING

For complete fixture, order housing with trim.

#### New Construction IC



**P645-TG**  
Ceiling opening: 6-7/8"  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-5/8"  
Pryouts: 1/2" and 3/4"

- **P645-TG**
- Maintains lamp in a vertical position from a 0° to a 45° slope (0/12 to 12/12 pitch)
- Easy spring installation of trims
- Bar hangers, with nail grip feature, span to position housing anywhere within 24" joist spacing
- Locking screw to secure housing in place
- Rated for 8 #12 90° conductors (4 in/4 out)
- Integral Romex clamps
- Integral nailer and T-bar clamps
- UL and CUL listed for damp locations and through wiring
- Can be installed in ceiling from 1/2" to 3/4"

#### New Construction Air-Tight & IC



**P645-AT**  
Ceiling opening: 6-7/8"  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-5/8"  
Pryouts: 1/2" and 3/4"

- **P645-AT**
- Maintains lamp in a vertical position from a 0° to a 45° slope (0/12 to 12/12 pitch)
- Meets Washington State Energy Code requirements
- Bar hangers, with nail grip feature, span to position housing anywhere within 24" joist spacing
- Locking screw to secure housing in place
- Rated for 8 #12 90° conductors (4 in/4 out)
- Integral Romex clamps
- Integral nailer and T-bar clamps
- UL and CUL listed for damp locations and through wiring
- Can be installed in ceiling from 1/2" to 3/4"

### 6" 45° REMODEL SLOPED CEILING HOUSING

For complete fixture, order housing with trim.

#### Remodel IC



**P745-IC**  
Ceiling opening: 7-3/8"  
Recessed depth: 7-1/4"  
Pryouts: 1/2"

- **P745-IC**
- Maintains lamp in a vertical position from a 0° to a 45° slope (0/12 to 12/12 pitch)
- Easy spring installation of trims
- Bar hangers, with nail grip feature, span to position housing anywhere within 24" joist spacing
- Slide bars stay in place, and have locking screw to secure housing in place
- Rated for 4 #12 90° conductors (2 in/2 out)
- Integral Romex clamps
- Integral nailer and T-bar clamps
- UL and CUL listed for damp locations and through wiring
- Can be installed in ceiling from 1/2" to 1-1/2"

## TRIMS

### Baffles



**P8004-28** White



**P8004-31** Black



**P8004-20** Antique Bronze

8-1/4" outside diameter

## LAMPS

Catalog No.	Lamp(s)
P645-TG	65w BR 30, 75w BR30/PAR 30LN
P645-AT	65w BR 30, 75w PAR 30LN
P745-IC	65w BR 30, 75w PAR 30LN

Lamp wattages shown are maximum.  
For accessories see page 680.

## HOUSINGS & TRIMS



### 8" 45° REMODEL SLOPED CEILING HOUSINGS

For complete fixture, order housing with trim.

#### Remodel IC



#### P245-TG

Ceiling opening: 9"  
Recessed depth: 7-13/16"  
Pryouts: 1/2"

#### P245-TG

- UL and CUL listed for damp locations and through wiring
- Single spring installation of trims
- Lamp is adjustable to vertical position in 9° to 45° ceilings (2/12 to 12/12 pitch)
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end of run applications
- Exclusive mounting bars permit quick and solid mounting
- Cast trim flange is integral part of housing
- Can be installed in ceilings from 1/2" to 3/4" thickness

### 8" 45° SLOPED CEILING HOUSING

For complete fixture, order housing with trim.

#### New Construction Air-Tight & IC



#### P45-AT

Ceiling opening: 8-3/4"  
Plaster frame: 15-3/4" x 9-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

#### P45-AT

- Maintains lamp in a vertical position in 9° to 45° ceilings (2/12 to 12/12 pitch)
- Single spring installation of trims
- Meets Washington state energy code requirements
- Integral nailer and T-bar mounting clamp
- UL & CUL listed for damp locations and through wiring
- Can be installed in ceilings from 1/2" to 3/4" thick

## TRIMS

9-3/4" outside diameter

#### Baffle



P8000-28 White



P8000-31 Black

#### Alzak® Cones



P8001-21 Clear Alzak®



P8001-22 Gold Alzak®

## LAMPS

Catalog No.	Lamp(s)
P45-AT	120w PAR 38, BR40
P245-TG	75w PAR 38, BR40
P145-TG	250w R40, PAR 38, BR40



# 5" INCANDESCENT

## HOUSINGS & TRIMS

### STANDARD IC AND NON-IC UNIVERSAL HOUSINGS

FOR COMPLETE FIXTURE, ORDER HOUSING WITH TRIM.

#### New Construction Air-Tight IC



##### P85-AT

Ceiling opening: 5-1/4"  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-5/8"  
Pryouts: 1/2" and 3/4"

##### P85-AT

- Rated for direct contact with ceiling insulation
- Trims are Easy-in and push-lock into place
- Notched mounting frame for easy alignment
- Slotted, interlocking bar hangers provide solid mounting on 24" centers.
- P85-AT meets Washington State Energy Code requirements

#### New Construction Non-IC



##### P85-TG

Ceiling opening: 5-1/4"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

##### P85-TG

- Nail grip bar hangers accommodate 24" on center ceiling joists or T-bars, and have locking feature to secure housing in place
- Integral T-bar clamps on bar hangers
- Complete with grounding pigtail
- UL and CUL Listed for damp locations and through wiring
- Integral Romex clamps
- Rated for 8 #12 90° conductors (4 in/4 out)
- Can be installed in ceilings from 1/2" to 2" thickness

#### Remodel Non-IC



##### P185-TG

Ceiling opening: 5-1/8"  
Recessed depth: 7-1/2"  
Pryouts: 1/2"

##### P185-TG

- Locking clips (furnished) permit quick mounting in ceiling
- Can be installed in ceilings 1/2" to 1-3/4"
- Rated for 4 no.12 90° conductors (2 in/2 out)
- Rated 60° degrees supply wires in end-of-run applications.
- Trims are easy in and push into place

## IC/NON-IC TRIMS

For insulated and non-insulated ceilings.  
6-1/8" outside diameter, except where indicated.

#### Open



**P8168-28** White  
IC Lamp: 65w BR30,  
50w PAR 30 long neck  
Non-IC Lamp: 85w BR30,  
75w PAR 30 long neck,  
60w A19

#### Eyeball



**P8176-28** White  
**P8176-20** Antique Bronze  
OD: 6-3/8"  
IC/Non-IC Lamp: 75w  
PAR30 short neck

#### Deep Cone



**P8172-09** Brushed Nickel  
IC Lamp: 65w BR30,  
50w PAR30 short neck  
Non-IC Lamp: 85w BR30,  
75w PAR30 short neck

#### Deep Cone



**P8172-21A** Clear Alzak®  
**P8172-22A** Gold Alzak®  
White flange  
IC Lamp: 65w BR30,  
50w PAR30 short neck  
Non-IC Lamp: 85w BR30,  
75w PAR30 short neck

#### Step Baffle



**P8175-31** Black  
**P8175-28** White  
IC Lamp: 65w BR 30,  
50w PAR 30 long neck  
Non-IC Lamp: 65w BR 30,  
50w PAR-30 long neck,  
40w A19

#### Step Baffle



**P8175-20** Antique Bronze  
IC Lamp: 65w BR 30,  
50w PAR 30 long neck  
Non-IC Lamp: 65w BR 30,  
50w PAR-30 long neck,  
40w A19

#### Open Shower Trim Wet location listed



**P8367WL-28** White  
Metal flange  
IC/Non IC Lamp: 50w  
PAR 30 short neck\*

#### Shower Light Wet location listed



**P8109-28** White  
Metal flange  
IC Lamp: 40w A19,  
50w PAR30  
Non-IC: 60w A19,  
75w PAR30

Lamp wattages shown are maximum.

For accessories see page 680.

Patent Pending

\* WL trims require use with  
outdoor rated PAR lamps

progresslighting.com




# 5" INCANDESCENT

## SHALLOW HOUSINGS & TRIMS

### SHALLOW IC AND NON-IC UNIVERSAL HOUSINGS

For complete fixture, order housing with trim.

#### New Construction Air-Tight IC and Non-IC

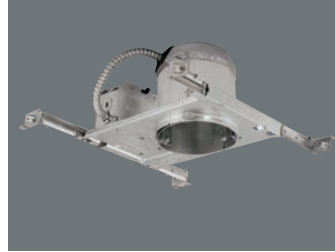

**P84-AT**  
Ceiling opening: 5-1/4"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2" and 3/4"

- P84-AT**
- Notched mounting frame for easy alignment
  - Can be installed in ceilings from 1/2" to 2" thick
  - Nail grip bar hangers accommodate up to 24" on center ceiling joists
  - Slotted interlocking bar hangers provide solid mounting on 24" centers
  - Locking feature to secure housing
  - Integral T-bar clamps
  - Integral Romex clamps
  - UL & CUL listed for damp locations & through wiring
  - Rated for 8 #12 90 degree conductors (4 in/4 out)
  - Trims are easy-in & push-lock into place
  - Shallow profile (5-1/2") for 2x6 construction
  - Adjustable lamp position
  - Meets Washington State Energy Code requirements

#### Shallow Remodel IC and Non-IC



**P184-TG**  
Ceiling opening: 5-1/8"  
Recessed depth: 5-1/2"  
Pryouts: 1/2"

- P184-TG**
- Locking clips (furnished) permit quick mounting in ceiling
  - Can be installed in ceilings from 1/2" to 1-3/4" thick.
  - UL & CUL listed for damp locations
  - Rated for 4 #12 90 degree conductors (2 in/2 out).
  - Rated for 60 degree supply wires in end-of-run applications.
  - Trims are easy-in & push-lock into place
  - Shallow profile (5-1/2") for 2x6 construction

### IC/NON-IC TRIMS

For insulated and non-insulated ceilings.  
6-1/8" outside diameter. IC/Non IC applications.

#### Shallow Baffle



**P8375-28 White**  
**P8375-31 Black**  
IC/Non IC Lamp: 65w  
BR-30, 50w PAR-30

#### Open



**P8368-28 White**  
IC/Non-IC Lamp: 65w  
BR-30, 50w PAR-30

#### Alzak®



**P8368-21A Clear Alzak®**  
IC/Non-IC Lamp: 65w  
BR-30, 50w PAR-30

#### Alzak®



**P8368-22A Gold Alzak®**  
IC/Non-IC Lamp: 65w  
BR-30, 50w PAR-30

#### Eyeball



**P8176-28 White**  
OD: 6-3/8"  
IC/Non IC Lamp: 75w  
PAR-30 short neck

#### Eyeball



**P8176-20 Antique Bronze**  
OD: 6-3/8"  
IC/Non IC Lamp: 75w  
PAR-30 short neck

#### Drop Opal Shower Wet location listed



**P8109-28 White**  
Metal flange  
IC/Non-IC Lamp: 30w R-20

#### Open Shower Trim Wet location listed



**P8367-WL28 White**  
IC/Non IC Lamp:  
50w PAR 30\*

# 4" INCANDESCENT

## HOUSINGS & TRIMS

### IC, AIR-TIGHT HOUSING

#### New Construction Air-Tight, IC



**P831-AT**  
Ceiling opening: 4-1/2"  
Plaster frame: 8-3/8" x 13"  
Recessed depth: 7-1/2"

#### P831-AT

- Integral Romex clamp
- Notched plaster frame for easy alignment
- Trim mounted socket snaps into trim for consistent lamp positioning
- UL and CUL listed for damp locations and feed through wiring
- Rated for 8 #12 90° conductors (4 in/4 out)
- Nail grip bar hangers accommodate up to 24" on center ceiling joists
- Integral T-bar clamps
- Locking feature to secure housing
- Adjustable from 1/2" to 2-1/2" ceiling thickness
- Shipped in air-tight configuration
- Meets WSEC code requirements

### NON-IC HOUSINGS

#### New Construction Non-IC



**P830-TG**  
Ceiling opening: 4-1/2"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2" and 3/4"

#### P830-TG

- Integral Romex clamp
- Notched plaster frame for easy alignment
- Trim mounted socket snaps into trim for consistent lamp positioning
- UL and CUL listed for damp locations and through wiring
- Rated for 8 #12 90° conductors (4 in/4 out)
- Nail grip bar hangers accommodate up to 24" on center ceiling joists
- Integral T-bar clamps
- Locking feature to secure housing
- Adjustable from 1/2" to 2-1/2" ceiling thickness

#### Remodel Non-IC



**P832-TG**  
Ceiling opening: 4-1/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2"

#### P832-TG

- Retrofit version of P830-TG for use in existing ceilings
- Integral flange on housing and exclusive locking bars permits quick mounting in ceilings from 1/2" to 1" thick
- Attached junction box with removable sides
- UL and CUL listed for damp locations and through wiring

### IC TRIMS

#### Open



**P8041-09** Brushed Nickel  
Lamp: 55w PAR 16, 50w PAR 20, R20

#### Eyeball



**P8046-28** White  
**P8046-09** Brushed Nickel  
**P8046-20** Antique Bronze  
Lamp: 40w PAR 16, 30w R 20

#### Alzak® Cone



**P8048-21** Clear Alzak®  
Lamp: 75w PAR 16, R 20, 50w PAR 20



**P8041-28** White  
Lamp: 55w PAR 16, 50w PAR 20, R20

#### Step Baffle



**P8044-31** Black Baffle  
**P8044-09** Brushed Nickel  
**P8044-28** White Baffle

#### Alzak® Cone



**P8049-31** Black Alzak®  
Lamp: 75w PAR 16, R 20, 50w PAR 20

#### Pinhole



**P8042-28** White  
Lamp: 40w PAR 16, 30w R20



**P8044-20** Antique Bronze  
Lamp: 55w PAR 16, 50w PAR 20, R20

#### Open Shower Trim



**P8041WL-28** White  
Wet location listed  
Lamp: 50w PAR 20\*

#### Wall Washer



**P8047-31** White w/Black Baffle  
Lamp: 40w PAR 16, 30w R 20

#### Alzak® Cone



**P8043-22** Gold Alzak®  
**P8043-21** Clear Alzak®  
Lamp: 75w PAR 16, R 20, 50w PAR 20

### NON-IC TRIMS

Insulation must be 3" from housing 5" outside diameter. Lamps tilt 20°

#### Step Baffle



**P8044-09** Brushed Nickel  
**P8044-20** Antique Bronze  
Unpainted flange

#### Eyeball



**P8046-20** Antique Bronze  
Lamp: 75w PAR 16, 50w PAR 20

#### Alzak® Cone



**P8043-21** Clear Alzak®  
Lamp: 55w PAR 16, 50w PAR 20, R 20



**P8044-28** White  
**P8044-31** Black  
Lamp: 55w PAR 16, 50w PAR 20, R 20

#### Pinhole Spot



**P8042-28** White  
Lamp: 40w PAR 16, 30w R 20

#### Alzak® Cone



**P8043-22** Gold Alzak®  
Lamp: 55w PAR 16, 50w PAR 20, R 20

#### Eyeball



**P8046-09** Brushed Nickel  
**P8046-28** White  
Lamp: 75w PAR 16, 50w PAR 20

#### Wall Washer



**P8047-31** White w/Black Baffle  
Lamp: 40w PAR 16, 30w R 20, PAR 20

#### Open Shower Trim



**P8041WL-28** White  
Wet location listed  
Lamp: 50w PAR 20\*

## HOUSINGS & TRIMS

For complete fixture, order housing with trim.

### LOW VOLTAGE HOUSINGS

#### New Construction Air-Tight and IC



##### P817-AT

Ceiling opening: 4-1/2"  
Plaster frame: 15-3/4" x 9-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

##### P817-AT

- UL and CUL Listed for damp locations and through wiring
- Meets Washington State Energy Code requirements
- Electronic transformer
- Can be installed in ceilings from 1/2" to 2-1/2" thick.
- Rated for 8 #12 90° conductors (4 in/4 out)

#### New Construction Non-IC




##### P816-TG

Ceiling opening: 4-1/2"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2" and 3/4"

##### P816-TG

- UL and CUL Listed for damp locations and through wiring
- Rated for 8 #12 90° conductors (4 in/4 out)
- Can be installed in ceilings from 1/2" to 2-1/2" thick.
- Magnetic transformer

#### Remodel Non-IC

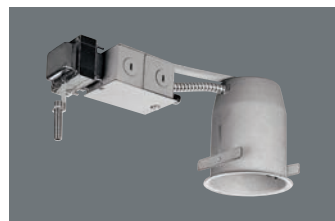

##### P818-TG

Ceiling opening: 4-1/4"  
Recessed depth: 5-1/2"  
Pryouts: 1/2"

##### P818-TG

- Integral flange on housing and exclusive locking bars permit quick mounting on ceilings from 1/2" to 1" thick
- UL & CUL Listed for damp locations
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end-of-run applications.
- Magnetic transformer

Lamp wattages shown are maximum.  
For accessories see page 680 for details.

### IC TRIMS & NON-IC TRIMS

5" outside diameter All trims have 360° positioning  
Lamps tilt 30° max.

#### Step Baffle



**P8037-28** White Baffle  
IC/Non-IC Lamp: 12V  
50w MR-16



**P8037-31** Black Baffle  
IC/Non-IC Lamp: 12V  
50w MR-16



**P8037-09** Brushed Nickel  
IC/Non-IC Lamp: 12V 50w  
MR-16

#### Slotted



**P8039-28** White  
IC Lamp: 12V 35w MR-16  
Non-IC Lamp: 12V 50w  
MR-16

#### Pinhole



**P8036-28** White  
IC Lamp: 12V 35w MR-16  
Non-IC Lamp: 12V 50w  
MR-16

#### Wall Washer



**P8045-31** White w/ Black Baffle  
IC Lamp: 12V 35w MR-16  
Non-IC Lamp: 12V 50w MR-16

#### Eyeball



**P8057-28** White  
Rotates 360°, tilts 30°  
IC/Non-IC Lamp: 12V 50w  
MR-16



**P8057-20** Antique Bronze  
IC/Non-IC Lamp: 12V 50w  
MR-16

#### Alzak® Cone



**P8056-21** Clear Alzak®  
IC/Non-IC Lamp: 12V  
50w MR-16

# 6" COMPACT FLUORESCENT

## HOUSINGS & TRIMS – 26W

For complete fixture, order housing with trim.

### New Construction Air-Tight, IC 26w



#### P83-26ICAT

Ceiling opening: 6-7/8"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

#### P83-26ICAT

- Quick-connects allow simple installation of 12-20 AWG wire, without the need for wire nuts
- 120V NPF electronic ballast
- Meets California T-24 requirements
- Not rated for through branch, but can be "daisy-chained"
- One 26w 4-pin triple CFL vertically mounted
- Nail bar hangers span 24" T-bar spacing
- Can be installed in ceilings from 1/2" to 2" thick
- Meets WSEC code requirements

### New Construction and Remodel Dimmable 26w



#### P83-26ICATDM

Ceiling opening: 6-7/8"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

#### P83-26ICATDM

- 120V NPF electronic dimmable ballast. Dimmable to 15% of lamp output on standard incandescent dimmers
- Meets California T-24 requirements
- Not rated for through branch, but can be "daisy-chained"
- One 26w 4-pin triple CFL vertically mounted
- Nail bar hangers span 24" T-bar spacing
- Can be installed in ceilings from 1/2" to 2" thick
- Meets WSEC code requirements

### Remodel IC 26w



#### P183-26EB

Ceiling opening: 6-5/8"  
Recessed depth: 7-1/2"  
Pryouts: 1/2"

#### P183-26EB

- 120V NPF electronic ballast
- Exclusive slide mounting bars permit quick and solid mounting in ceilings
- Can be installed in ceilings from 1/2" to 1-1/2" thick.
- UL and CUL listed for damp locations and through wiring
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end of run applications
- One 26w 4-pin triple CFL vertically mounted
- Meets WSEC code requirements

### Remodel IC Dimmable 26w



#### P183-26DM

Ceiling opening: 6-5/8"  
Recessed depth: 7-1/2"  
Pryouts: 1/2"

#### P183-26DM

- 120V NPF electronic dimmable ballast. Dimmable to 15% of lamp output on standard incandescent dimmers
- Exclusive slide mounting bars permit quick and solid mounting in ceilings
- Can be installed in ceilings from 1/2" to 1-1/2" thick.
- UL and CUL listed for damp locations and through wiring
- Rated for 4 #12 90° conductors (2 in/2 out)
- Rated for 60° supply wires in end of run applications
- One 26w 4-pin triple CFL vertically mounted
- Meets WSEC code requirements



Catalog No: **P83-26ICAT, P183-26EB, P83-26ICATDM, P183-26DM**

Wattage: 26w

Lamp base: GX24q-3, 4-pin

Lamp type: Triple

Trim no.	Lamp*	Maximum Length of Lamp
P8025	GE F26TBX, Philips PLT26, Sylvania CF26DT	5.3"
P8052, P8053, P8054	GE F26TBX, Philips PLT26, Sylvania CF26DT	5.5"
P8060, P8062, P8008	Sylvania CF26DT	4.8"
P8066, P8068, P8072, P8075	GE F26TBX, Philips PLT26, Sylvania CF26DT	5.5"
P8096	GE F26TBX, Philips PLT26, Sylvania CF26DT	5.9"

\* Partial lamp list of maximum wattages and lengths.  
Consult lamp manufacturers for available lamps with  
M.O.L. requirements.



## IC HOUSINGS & TRIMS – 26W

7-3/4" outside diameter, except where indicated  
IC trims may be used as non-IC trims with same wattages.

**Baffle**



**P8075-28** White

**Baffle**



**P8075-31** Black

**Open Splay**



**P8072-28** White

**Wall Washer**



**P8052-28** White Baffle

**Step Baffle**



**P8066-28** White

**Baffle**



**P8066-31** Black

**Open Splay**



**P8066-09** Brushed Nickel\*  
**P8066-20** Antique Bronze  
\*Unpainted Flange

**Cone**



**P8068-21A** Clear Alzak®

**Cone**



**P8068-22A** Gold Alzak®  
**P8068-28** White

**Cone**



**P8053-31** Black Alzak®  
Black Flange

## IC TRIMS: WET LOCATION LISTED

7-3/4" outside diameter, except as noted. IC trims may be used as non-IC trims with same wattages

**Dome Shower**



**P8025-60** White  
Polycarbonate  
Wet location listed  
8-3/4" outside diameter

**Drop Opal Shower**



**P8096-60** White  
Wet location listed  
Non-metallic flange

**Fresnel**



**P8062-28** White  
Wet location listed  
Metal flange

**Albalite - Metal**



**P8060-28** White  
Wet location listed  
Metal flange

**Albalite - Plastic**



**P8008-60** White  
Wet location listed  
Non-metallic flange





# 6" COMPACT FLUORESCENT

## HOUSINGS & TRIMS – 13W, 18W

For complete fixture, order housing with trim.

### New Construction Air Tight, IC 13w



### New Construction Air Tight, IC 13w



### New Construction Air Tight, IC 18w



#### P83-ICAT

Ceiling opening: 6-7/8"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"



#### P83-AT

Ceiling opening: 6-7/8"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"



#### P88-ICAT

Ceiling opening: 6-7/8"  
Plaster frame: 7-7/8" x 10-3/4"  
Recessed depth: 7-1/2"  
Pryouts: 1/2" and 3/4"

- P83-ICAT
- 120V NPF electronic ballast
- One 13w 4-pin quad or triple CFL vertically mounted
- Meets California T-24 requirements
- Not rated for through branch, but can be "daisy-chained"
- Nail bar hangers span 24" T-bar spacing
- Can be installed in ceilings from 1/2" to 2" thick
- Meets ASTM E283 and WSEC for air-tight requirements

- P83-AT
- 120-277V HPF electronic ballast
- FCC rated Class A ballast
- One 13w 4-pin quad or triple CFL vertically mounted
- Accessory Ceiling Gasket
- Integral Romex clamp
- Spans 24" T-bar spacing
- Rated for 8 #12 90° conductors (4 in/4 out)
- Can be installed in ceilings from 1/2" to 2" thick
- Meets ASTM E283 and WSEC for air-tight requirements

- P88-ICAT
- 120V NPF electronic ballast
- Not rated for through branch, but can be "daisy-chained"
- One 18w 4-pin quad or triple CFL vertically mounted
- Meets California T-24 requirements
- Spans 24" T-bar spacing
- Can be installed in ceilings from 1/2" to 2" thick
- Meets ASTM E283 and WSEC for air-tight requirements

Catalog No: **P83-ICAT, P83-AT**  
Wattage: 13w  
Lamp base: GX24q-1 or GX24q-1, 4-pin  
Lamp type: Triple or Quad

Catalog No: **P88-ICAT, P183-EB**  
Wattage: 18w  
Lamp base: GX24q-2, 4-pin  
Lamp type: Triple or Quad

Trim No.	Lamp*	Maximum Length of Lamp
P8007, P8009	GE F13TBX, Sylvania CF13DT, Philips PLT18, Sylvania CF18DT	4.8"
P8025	GE F13DBX, GE F13TBX, Philips PLC13, Sylvania CF13DD, Sylvania CF13DT	5.3"
P8052, P8053, P8054	GE F13DBX, GE F13TBX, Philips PLC13, Sylvania CF13DD, Sylvania CF13DT	5.5"
P8008, P8060, P8062	GE F13DBX, GE F13TBX, Sylvania CF13DT	4.8"
P8066, P8068, P8072, P8075	GE F13DBX, GE F13TBX, Philips PLC13, Sylvania CF13DD, Sylvania CF13DT	5.5"
P8096	GE F13DBX, GE F13TBX, Philips PLC13, Sylvania CF13DD, Sylvania CF13DT	5.9"

Trim No.	Lamp*	Maximum Length of Lamp
P8007, P8009	Philips PLT18, Sylvania CF18DT	4.8"
P8025	GE F18TBX, Philips PLT18, Sylvania CF18DT	5.3"
P8052, P8053, P8054	GE F18TBX, Philips PLT18, Sylvania CF18DT	5.5"
P8008, P8060, P8062	GE F18TBX, Philips PLT18, Sylvania CF18DT	4.8"
P8066, P8068, P8072, P8075	GE F18TBX, Philips PLT18, Sylvania CF18DT,	5.5"
P8096	GEF18DBX, GE F18TBX, Philips PLC18, Philips PLT18, Sylvania CF18DD, Sylvania CF18DT	5.9"

\* Partial lamp list of maximum wattages and lengths.  
Consult lamp manufacturers for available lamps

## IC TRIMS

### Baffle



**P8075-28** White  
**P8075-31** Black Baffle

### Wall Washer



**P8052-28** White

### Open Splay



**P8072-28** White

### Step Baffle



**P8066-28** White

7-3/4" outside diameter, except where indicated. IC trims may be used as non-IC trims with same wattages. Trims are for use with compact fluorescent recessed fixtures listed in chart at left.

For accessories see page 680 for details.  
US Patent # 9758959, 9857766, 6004011

### Cone



**P8068-22A** Gold Alzak®



**P8068-21A** Clear Alzak®  
**P8068-28** White

### Cone



**P8053-31** Black



**P8066-20** Antique Bronze  
**P8066-09** Brushed Nickel\*  
**P8066-31** Black  
\*Unpainted Flange

## IC TRIMS: WET LOCATION LISTED

### Albalite



**P8060-28** White  
Wet location listed  
Metal flange

### Albalite



**P8008-60** White  
Wet location listed  
Non-metallic flange

### Dome Shower



**P8025-60**  
White Polycarbonate  
Wet location listed  
OD: 8-3/4"

### Fresnel



**P8062-28** White  
Wet location listed  
Metal flange

7-3/4" outside diameter, except as noted. IC trims may be used as non-IC trims with same wattages. Trims are for use with compact fluorescent recessed fixtures listed in chart at left.

For accessories see page 680 for details.  
US Patent # 9758959, 9857766, 6004011

### Drop Opal Shower



**P8096-60** White  
Wet location listed  
Non-metallic flange

### Drop Opal Shower



**P8007-60** White Glass  
Wet location listed  
Metal Flange  
OD: 8-1/4"

### Drop Opal Shower



**P8009-60** White  
Wet location listed  
Non-metallic flange

## 4" COMPACT FLUORESCENT

## HOUSINGS & TRIMS

For complete fixture, order housing with trim.

AT/IC 18w & 13w  
New Construction



**P830-18ICAT**  
**P830-13ICAT**  
Ceiling opening: 4-1/2"  
Plaster frame: 17-7/8" x 10-3/4"  
Recessed depth: 5-1/2"

**P830-18ICAT**  
**P830-13ICAT**



- 120V NPF electronic ballast
- One 13w or 18w GX24q triple CFL vertically mounted
- Exclusive slide mounting bars permit quick and solid mounting in ceilings
- Nail hanger spans 24" T-bar spacing
- UL and CUL listed for damp locations
- Meets WSEC for air-tight requirements

## TRIMS

5" outside diameter

### Open



**P8145-28** White



**P8145-21** Clear Anodized

### Baffle



**P8144-28** White



**P8144-31** Black

## HOUSINGS & TRIMS



### P8064-EBG4

Ceiling Opening: 5-3/8"

Ceiling Thickness: 1-1/4"

Plaster Frame: 9-1/16" x 15-1/2"

Pryouts: 1/2" and 3/4"

- Universal 120-277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty

### 1100 LUMEN OPEN MODULE TRIMS (P8064)



P8067-21A/30KG4  
P8067-21A/35KG4  
P8067-21A/40KG4



P8067-22A/30KG4  
P8067-22A/35KG4  
P8067-22A/40KG4



P8067-28/30KG4  
P8067-28/35KG4  
P8067-28/40KG4

### 2000 LUMEN OPEN MODULE TRIMS (P8064)



P8206-21A/30KG4  
P8206-21A/35KG4  
P8206-21A/40KG4



P8206-22A/30KG4  
P8206-22A/35KG4  
P8206-22A/40KG4



P8206-28/30KG4  
P8206-28/35KG4  
P8206-28/40KG4

## HOUSINGS & TRIMS



### P8152-EB

Ceiling Opening: 2-7/8"

Ceiling Thickness: 1/2" - 1-1/4"

Pryouts: 1/2"

- 120V high efficiency driver
- 3000K and 3500K
- 50,000 hour life at 70% lumen maintenance
- Suitable for wet locations, non-IC rated
- Forward phase dimmable to 10%
- 5 year warranty



P8153-28/30K  
P8153-28/35K



P8153-21A/30K  
P8153-21A/35K

## HOUSINGS & TRIMS



**P8216-DM**  
**P8216-277DM**  
**P8216-277EBDM 277V**

Ceiling Opening: 6-1/4"  
Ceiling Thickness: 1-1/4"  
Plaster Frame: 9-1/8" x 14"  
Pryouts: 1/2" and 3/4"

Built to order with a 2-4 week lead time

- Universal 120-277V high efficiency driver
- 3000K, 3500K and 4000K, 80 CRI
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12-90° conductors (4 in/4 out)
- Suitable for wet locations, non-IC rated
- 5 year warranty

### 900 LUMEN OPEN MODULE TRIMS (P8216)



**P8104-28/30K**  
**P8104-28/35K**  
**P8104-28/40K**

### 1300 LUMEN OPEN MODULE TRIMS (P8216)



**P8105-28/30K**  
**P8105-28/35K**  
**P8105-28/40K**

### 1500 LUMEN OPEN MODULE TRIMS (P8216)



**P8106-28/30K**  
**P8106-28/35K**  
**P8106-28/40K**



## HOUSINGS & TRIMS



### P8023-EBG4

### P8212-EB120VG4

### P8212-EB277VG4


Ceiling Opening: 6-1/4"

Ceiling Thickness: 1-1/4"

Plaster Frame: 9-1/16" x 15-1/2"

Pryouts: 1/2" and 3/4"

- Universal 120-277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty

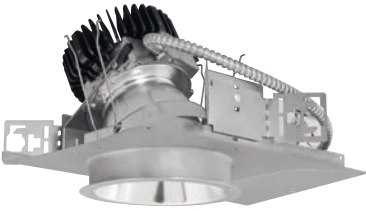

### Wall Washer

### P8005-EBG4

### P8223-EB120VG4

### P8223-EB277VG4

Ceiling Opening: 6-1/4"

Ceiling Thickness: 1-1/4"

Plaster Frame: 9-1/16" x 15-1/2"

Pryouts: 1/2" and 3/4"

- Wall wash orientation field adjustable in 90° increments
- Universal 120-277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty

## 1100 LUMEN OPEN MODULE TRIMS FOR P8023



P8021-21A/30KG4  
P8021-21A/35KG4  
P8021-21A/40KG4



P8021-22A/30KG4  
P8021-22A/35KG4  
P8021-22A/40KG4



P8021-28/30KG4  
P8021-28/35KG4  
P8021-28/40KG4

## 2000 LUMEN OPEN MODULE TRIMS FOR P8023



P8050-21A/30KG4  
P8050-21A/35KG4  
P8050-21A/40KG4



P8050-22A/30KG4  
P8050-22A/35KG4  
P8050-22A/40KG4



P8050-28/30KG4  
P8050-28/35KG4  
P8050-28/40KG4

## 2800 LUMEN OPEN MODULE TRIMS FOR P8212



P8112-21A/30KG4  
P8112-21A/35KG4  
P8112-21A/40KG4



P8112-22A/30KG4  
P8112-22A/35KG4  
P8112-22A/40KG4



P8112-28/30KG4  
P8112-28/35KG4  
P8112-28/40KG4

## 1100 LUMEN WALL WASH MODULE FOR P8005



P8006-21A/30KG4  
P8006-21A/35KG4  
P8006-21A/40KG4



P8006-22A/30KG4  
P8006-22A/35KG4  
P8006-22A/40KG4

## 2000 LUMEN WALL WASH MODULE FOR P8005



P8051-21A/30KG4  
P8051-21A/35KG4  
P8051-21A/40KG4



P8051-22A/30KG4  
P8051-22A/35KG4  
P8051-22A/40KG4

## 2800 LUMEN WALL WASH MODULE FOR P8223



P8123-21A/30KG4  
P8123-21A/35KG4  
P8123-21A/40KG4



P8123-22A/30KG4  
P8123-22A/35KG4  
P8123-22A/40KG4



P8123-28/30KG4  
P8123-28/35KG4  
P8123-28/40KG4



## HOUSINGS & TRIMS



### P8002-EBG4

Ceiling Opening: min. 6-1/8" max. 6-1/2"

**P8002-EBSDG4** (Must use WF trims)

Ceiling Opening: min. 5-15/16" max. 6-1/8"

Ceiling Thickness: 1-1/2"

Plaster Frame: 7" x 12-3/4" to 15"

Pryouts: 1/2" and 3/4"

- Universal 120-277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty



### P8214-EB277VG4

### P8214-EB120VG4

Ceiling Opening: min. 6-1/8" max. 6-1/2"

**P8214-EBSD120VG4** (Must use WF trims)

**P8214-EBSD277VG4** (Must use WF trims)

Ceiling Opening: min. 5-15/16" max. 6-1/8"

Ceiling Thickness: 1-1/2"

Plaster Frame: 7" x 12-3/4" to 15"

Pryouts: 1/2" and 3/4"

- 120V or 277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Suitable for wet locations, non-IC rated
- 5 year warranty

## 1100 LUMEN OPEN MODULE TRIMS FOR P8002EB



P8021-21A/30KG4  
P8021-21A/35KG4  
P8021-21A/40KG4



P8021-22A/30KG4  
P8021-22A/35KG4  
P8021-22A/40KG4



P8021-28/30KG4  
P8021-28/35KG4  
P8021-28/40KG4

## 1100 LUMEN OPEN MODULE TRIMS FOR P8002EBSB



P8021-21A/30KWFG4  
P8021-21A/35KWFG4  
P8021-21A/40KWFG4



P8021-22A/30KWFG4  
P8021-22A/35KWFG4  
P8021-22A/40KWFG4



P8021-28/30KWFG4  
P8021-28/35KWFG4  
P8021-28/40KWFG4

## 2000 LUMEN OPEN MODULE TRIMS FOR P8002EB



P8050-21A/30KG4  
P8050-21A/35KG4  
P8050-21A/40KG4



P8050-22A/30KG4  
P8050-22A/35KG4  
P8050-22A/40KG4



P8050-28/30KG4  
P8050-28/35KG4  
P8050-28/40KG4

## 2000 LUMEN OPEN MODULE TRIMS FOR P8002EBSB



P8050-21A/30KWFG4  
P8050-21A/35KWFG4  
P8050-21A/40KWFG4



P8050-22A/30KWFG4  
P8050-22A/35KWFG4  
P8050-22A/40KWFG4



P8050-28/30KWFG4  
P8050-28/35KWFG4  
P8050-28/40KWFG4

## 2800 LUMEN OPEN MODULE TRIMS FOR P8214



P8112-21A/30KG4  
P8112-21A/35KG4  
P8112-21A/40KG4



P8112-22A/30KG4  
P8112-22A/35KG4  
P8112-22A/40KG4



P8112-28/30KG4  
P8112-28/35KG4  
P8112-28/40KG4

## 2800 LUMEN OPEN MODULE TRIMS FOR P8214-EBSD



P8112-21A/30KWFG4  
P8112-21A/35KWFG4  
P8112-21A/40KWFG4



P8112-22A/30KWFG4  
P8112-22A/35KWFG4  
P8112-22A/40KWFG4



P8112-28/30KWFG4  
P8112-28/35KWFG4  
P8112-28/40KWFG4

## HOUSINGS & TRIMS



### P8220-EB120VG4

### P8220-EB277VG4

Ceiling Opening: 6-1/4"

Ceiling Thickness: 1-1/4"

Plaster Frame: 9-1/16" x 15-1/2"

Pryouts: 1/2" and 3/4"

- 120V or 277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty



### P8103-EBG4

Ceiling Opening: 6-1/4"

Ceiling Thickness: 1-1/4"

Plaster Frame: 9-1/16" x 15-1/2"

Pryouts: 1/2" and 3/4"

- 120V or 277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Light commercial bar hangers included
- Suitable for wet locations, non-IC rated
- 5 year warranty

## 2800 LUMEN OPEN MODULE TRIMS FOR P8220



P8120-21A/30KG4  
P8120-21A/35KG4  
P8120-21A/40KG4



P8120-22A/30KG4  
P8120-22A/35KG4  
P8120-22A/40KG4



P8120-28/30KG4  
P8120-28/35KG4  
P8120-28/40KG4



## 1100 LUMEN OPEN MODULE TRIMS FOR P8103



P8121-21A/30KG4  
P8121-21A/35KG4  
P8121-21A/40KG4



P8121-22A/30KG4  
P8121-22A/35KG4  
P8121-22A/40KG4



P8121-28/30KG4  
P8121-28/35KG4  
P8121-28/40KG4

## 2000 LUMEN OPEN MODULE TRIMS FOR P8103



P8133-21A/30KG4  
P8133-21A/35KG4  
P8133-21A/40KG4



P8133-22A/30KG4  
P8133-22A/35KG4  
P8133-22A/40KG4



P8133-28/30KG4  
P8133-28/35KG4  
P8133-28/40KG4

## HOUSINGS & TRIMS



### P8102-EBG4

Ceiling Opening: min. 8-1/8" max. 8-3/4"

**P8102-EBSDG4** (Must use WF trims)

Ceiling Opening: min. 7-15/16" max. 8-1/8"

Ceiling Thickness: 1-1/2"

Plaster Frame: 9" x 13-3/4" to 16"

Pryouts: 1/2" and 3/4"

- Universal 120-277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Suitable for wet locations, non-IC rated
- 5 year warranty



### P8215-EB120VG4

### P8215-EB277VG4

Ceiling Opening: min. 8-1/8" max. 8-3/4"

**P8215-EBSD120VG4** (Must use WF trims)

**P8215-EBSD277VG4** (Must use WF trims)

Ceiling Opening: min. 7-15/16" max. 8-1/8"

Ceiling Thickness: 1-1/2"

Plaster Frame: 9" x 13-3/4" to 16"

Pryouts: 1/2" and 3/4"

- 120V or 277V high efficiency driver
- Remote phosphor technology for controlled color consistency
- 3000K, 3500K and 4000K, 80 CRI
- 50 lumens per watt fixture efficacy
- 50,000 hour life at 70% lumen maintenance
- J-box rated for (8) #12 90° conductors (4 in/4 out)
- Suitable for wet locations, non-IC rated
- 5 year warranty

## 1100 LUMEN OPEN MODULE TRIMS FOR P8102-EB



P8121-21A/30KG4  
P8121-21A/35KG4  
P8121-21A/40KG4



P8121-22A/30KG4  
P8121-22A/35KG4  
P8121-22A/40KG4



P8121-28/30KG4  
P8121-28/35KG4  
P8121-28/40KG4

## 1100 LUMEN OPEN MODULE TRIMS FOR P8102-EBSD



P8121-21A/30KWFG4  
P8121-21A/35KWFG4  
P8121-21A/40KWFG4



P8121-22A/30KWFG4  
P8121-22A/35KWFG4  
P8121-22A/40KWFG4



P8121-28/30KWFG4  
P8121-28/35KWFG4  
P8121-28/40KWFG4

## 2000 LUMEN OPEN MODULE TRIMS FOR P8102-EB



P8133-21A/30KG4  
P8133-21A/35KG4  
P8133-21A/40KG4



P8133-22A/30KG4  
P8133-22A/35KG4  
P8133-22A/40KG4



P8133-28/30KG4  
P8133-28/35KG4  
P8133-28/40KG4

## 2000 LUMEN OPEN MODULE TRIMS (P8102-EBSD)



P8133-21A/30KWFG4  
P8133-21A/35KWFG4  
P8133-21A/40KWFG4



P8133-22A/30KWFG4  
P8133-22A/35KWFG4  
P8133-22A/40KWFG4



P8133-28/30KWFG4  
P8133-28/35KWFG4  
P8133-28/40KWFG4

## 2800 LUMEN OPEN MODULE TRIMS (P8215)



P8120-21A/30KG4  
P8120-21A/35KG4  
P8120-21A/40KG4



P8120-22A/30KG4  
P8120-22A/35KG4  
P8120-22A/40KG4



P8120-28/30KG4  
P8120-28/35KG4  
P8120-28/40KG4

## 2800 LUMEN OPEN MODULE TRIMS (P8215-EBSD)



P8120-21A/30KWFG4  
P8120-21A/35KWFG4  
P8120-21A/40KWFG4



P8120-22A/30KWFG4  
P8120-22A/35KWFG4  
P8120-22A/40KWFG4



P8120-28/30KWFG4  
P8120-28/35KWFG4  
P8120-28/40KWFG4

# 6" CFL: NEW CONSTRUCTION

PRO-OPTIC®

## HOUSINGS & TRIMS



P63-EB shown with P8030-21A trim

Catalog No.	Ballast	Wattage	Lamp Base	Line Current (Amps)	Input (Watts)	Power Factor	Minimum START Temp. (°F)
<b>P63-EB</b>	120/277V Electronic	2 13w Quad 4-Pin	GX24q-1	0.25/0.11	29	>0.90	0
<b>P63-EBEM</b>							
<b>P66-EB</b>	120/277V Electronic	2 26w Quad 4-Pin	GX24q-3	0.45/0.20	54	>0.90	0
<b>P66-EBEM</b>							
<b>P66-DM</b>	120 Electronic Dimmable	2 26w Quad 4-Pin	GX24q-3	0.48	54	>0.90	50
<b>P66-DBEM</b>							
<b>P68-EB</b>	120/277V Electronic	2 18w Quad 4-Pin	GX24q-2	0.33/0.14	39	>0.90	0
<b>P68-EBEM</b>							
<b>P6132-EB</b>	120/277V Electronic	1 26w Triple 4-Pin 1 32w Triple 4-Pin	GX24q-4 GX24q-4	0.24/0.11 0.31/0.13	29 36	>0.90 >0.90	0 0

Ceiling opening: 6-1/4" dia.  
Plaster frame: 9-1/16" x 14"  
Recessed depth: see trims  
Pryouts: 1/2" and 3/4"

- 120/277v HPF electronic ballast
- Bar hangers included
- J-box rated for 8 #12 90° conductors (4 in/4 out)
- cCSAus listed for damp locations
- Accommodates 1-1/4" thick ceilings
- EM at end of Catalog No. is for Integral Emergency Battery Pack. See Page 681 for details.



## TRIMS FOR P63, P66, P68

7" outside diameter (OD)  
5-3/4" aperture  
Recessed Depth: 4-3/4"  
(except as indicated)

### Open



P8030-28 White



P8030-21A Clear Alzak®



P8030-22A Gold Alzak®



P8032-21 Clear Alzak®  
RD: 5-3/4"

### Baffle



P8031-28 White



P8031-31 Black

### Regressed Prismatic Lens



P8035-68 White  
Wet location listed  
RD: 5-3/4"

### Regressed Fresnel Lens



P8034-83 White  
Wet location listed  
RD: 5-3/4"

\*MTO

## TRIMS FOR P6132-EB

7" outside diameter (OD)  
5-3/4" aperture  
Recessed Depth: 4-3/4"  
(except as indicated)

### Baffle



P8014-28 White

### Open



P8015-21A Clear Alzak®

### Regressed Prismatic Lens



P8016-68 White  
Wet location listed  
RD: 5-3/4"

### Regressed Fresnel Lens



P8016-83 White  
Wet location listed  
RD: 5-3/4"

### Baffle



P8014-31 Black

### Open



P8015-22A Gold Alzak®

## HOUSINGS & TRIMS



**P166H-DVEB** shown  
with P8030-21A trim

- Maximizes energy efficiency and helps meet lighting power density demands.
- cCSAus listed as a stand-alone product as a means to retrofit existing 6" downlight housings, no matter the brand or manufacturer of existing housing in ceiling.
- Requires no bar hangers for installation and are easily installed into drywall or t-bar ceilings, without requiring top access.
- Retrofit CFL is the only product on the market of its kind to be cCSAus listed, regardless of the housing above ceiling.

Catalog No.	Ballast	Wattage	Lamp Base	Line Current (Amps)	Input (Watts)	Power Factor	Minimum START Temp. (°F)
<b>P162H-DVEB*</b>	120/277V Electronic	1 26W Triple 4-Pin	GX24Q-3	0.24/0.11	29	>0.90	0
		1 32W Triple 4-Pin	GX24Q-3	0.31/0.13	36	>0.90	0
<b>P162H-DVEBSD*</b>	120/277V Electronic	1 26W Triple 4-Pin	GX24Q-3	0.24/0.11	29	>0.90	0
		32W Triple 4-Pin	GX24Q-3	0.31/0.13	36	>0.90	0
<b>P163H-DVEB*</b>	120/277V Electronic	2 13W Quad 4-Pin	G24Q-1	0.25/0.11	29	>0.90	0
<b>P163H-DVEBSD*</b>	120/277V Electronic	2 13W Quad 4-Pin	G24Q-1	0.25/0.11	29	>0.90	0
<b>P166H-DVEB*</b>	120/277V Electronic	2 26W Quad 4-Pin	G24Q-3	0.43/0.19	52	>0.90	0
<b>P166H-DVEBSD*</b>	120/277V Electronic	2 26W Quad 4-Pin	G24Q-3	0.43/0.19	52	>0.90	0
<b>P166H-DM*</b>	120 Electronic	2 26W Quad 4-Pin	G24Q-3	0.48	58	>0.90	50
<b>P166H-DMSD*</b>	120 Electronic	2 26W Quad 4-Pin	G24Q-3	0.48	58	>0.90	50
<b>P168H-DVEB*</b>	120/277V Electronic	2 18W Quad 4-Pin	G24Q-2	0.30/0.13	35	>0.90	0
<b>P168H-DVEBSD*</b>	120/277V Electronic	2 18W Quad 4-Pin	G24Q-2	0.30/0.13	35	>0.90	0

Use P8100-01 accessory with wide flange (WF) trims. Refer to housing compatibility guide on spec sheet.  
DM dimmable housings are 120V only. Dimmable to 5% with 2-wire switches compatible with Advance Mark X ballasts.  
All Retrofit housings listed above are MTO only. Consult Factory for timing. Normally 2 to 4 week turnaround.

## TRIMS FOR P162H

7" outside diameter (OD)  
5-3/4" aperture  
Recessed Depth(RD): 4-3/4"  
(except as indicated)

\*MTO: Made to Order

\* Wide flange trims go  
with SD Housings, MTO.

Open



**P8015-21A** Clear Alzak®  
**P8015-21AWF** Wide Flange\*

Baffle



**P8014-28** White  
RD: 7-1/8"



**P8014-31** Black

Regressed Prismatic Lens



**P8016-68** White  
Wet location listed  
RD: 5-3/4"

Regressed Fresnel Lens



**P8016-83** White  
Wet location listed  
RD: 5-3/4"

## TRIMS FOR P163H/168H/166H

7" outside diameter (OD)  
5-3/4" aperture  
Recessed Depth(RD): 4-3/4"  
(except as indicated)

\* Wide flange trims go  
with SD Housings, MTO.

Open



**P8030-28** White Alzak®  
**P8030-28WF** Wide Flange\*

Wall Wash



**P8030-21A** Clear Alzak®  
**P8030-21AWF** Wide Flange\*



**P8032-21A** Clear  
RD: 5-3/4"

Open



**P8030-22A** Gold Alzak®  
**P8030-22AWF** Wide Flange\*

Baffle



**P8031-28** White



**P8031-31** Black

Regressed Prismatic Lens



**P8035-28** White  
Wet location listed  
RD: 5-3/4"

Regressed Fresnel Lens



**P8034-83** White  
Wet location listed  
RD: 5-3/4"



# 8" CFL: NEW CONSTRUCTION

PRO-OPTIC®

## HOUSINGS & TRIMS



**P8226-DVEB** shown with  
P8130-21A trim

Ceiling opening: 8-3/16" dia.  
Plaster frame: 9-1/16" x 14"  
Recessed depth: see trims  
Pryouts: 1/2" and 3/4"

Catalog No.	Ballast	Lamp Wattage	Lamp Base	Line Current (Amps)	Input (Watts)	Minimum Start Temp. (°F)
<b>P8213-EB</b>	120/277V Elec.	2 13w Quad 4-Pin	GX24q-1	0.25/.11	29	0
<b>P8218-DVEB</b>	120/277V Elec.	2 18w Quad 4-Pin	GX24q-2	0.33/0.14	39	0
<b>P8218-DVEBEM*</b>	120/277V Elec.	2 18w Quad 4-Pin	GX24q-2	0.33/0.14	39	0
<b>P8226-DVEB</b>	120/277V Elec.	2 26w Quad 4-Pin	GX24q-3	0.45/0.20	54	0
<b>P8226-DVEBEM*</b>	120/277V Elec.	2 26w Quad 4-Pin	GX24q-3	0.45/0.20	54	0
<b>P8226-DM</b>	120V Elec.	2 26w Quad 4-Pin Dimmable	GX24q-3	0.46	54	50
<b>P8232-EB</b>	120/277V Elec.	2 32w Triple 4-Pin 2 42w Triple 4-Pin	GX24q-4	0.57/0.25 0.78/0.33	68 93	0 0
<b>P8232-EBEM*</b>	120/277V Elec.	2 32w Triple 4-Pin 2 42w Triple 4-Pin	GX24q-4	0.57/0.25 0.78/0.33	68 93	0 0

- 120/277V HPF electronic ballast
- Bar hangers span 24" T-bar spacing
- J-Box rated for 8 #12 90° conductors (4 in/4 out)

- Accommodates 1-1/4" thick ceilings
- cCSAus listed for damp locations

- EM at end of Catalog No. is for Integral Emergency Battery Pack. **MTO**  
See page 681 for details.

## TRIMS FOR P8213, P8218, P8226

9" outside diameter  
7-3/4" aperture  
Recessed Depth: 6"  
(except as indicated)

### Open



**P8130-21A** Clear Alzak®

### Baffle



**P8130-22A** Gold Alzak®



**P8131-28** White



**P8131-31** Black

### Shallow Cross Louver



**P8170-21A**  
3-7/8" overall height  
RD: 4-3/16"



**P8170-22A**  
3-7/8" overall height  
RD: 4-3/16"

### Regressed Prismatic Lens



**P8135-68**  
Wet location listed  
RD: 7-1/8"

### Wall Wash



**P8132-21**  
RD: 7-1/8"

## TRIMS FOR P8232EB

For use with P8232-EB only

9" outside diameter  
7-3/4" aperture  
Recessed Depth: 6"  
(except as indicated)

For use with all 6" and 8"  
standard housings

### Open



**P8115-21A** Clear Alzak®



**P8115-22A** Gold Alzak®

### Baffle



**P8114-28** White



**P8114-31** Black

### Regressed Prismatic Lens



**P8116-68** White  
Wet location listed  
RD: 7-1/8"

### Regressed Fresnel Lens



**P8116-83** White Fresnel  
Wet location listed  
RD: 7-1/8"

### Wall Wash



**P8113-21A** Clear Alzak®



**P8113-22A** Gold Alzak®

## EMERGENCY BATTERY PACK\*



Pro-Optic offers the ability to conceal the test button and indicator light inside the trim and between the lamps, completely out of sight of the general public. The tops of all open cone and baffle\* Pro-Optic trims are equipped with clearance holes for the emergency test switch and indicator light.

EM Options

All internal emergency housing are MTO.  
Add "EM" to end of standard SKU number.

\* 6" P8030 and P8031 series  
8" P8130 and 8131 series

## HOUSINGS & TRIMS



**P186H-DVEB** shown with  
P8130-21A trim

- Maximizes energy efficiency and helps meet lighting power density demands.
- cCSAus listed as a stand-alone product as a means to retrofit existing 8" downlight housings, no matter the brand or manufacturer of existing housing in ceiling.
- Requires no bar hangers for installation and are easily installed into drywall or t-bar ceilings, without requiring top access.
- Retrofit CFL is the only product on the market of its kind to be cCSAus listed, regardless of the housing above ceiling.

Catalog No.	Ballast	Wattage	Lamp Base	Line Current (Amps)	Input (Watts)	Power Factor	Minimum START Temp. (°F)
<b>P182H-DVEB</b>	120/277V Electronic	2 32W Triple 4-Pin	GX24Q-4	0.57/0.25	68	>0.90	0
	120/277V Electronic	2 42W Triple 4-Pin	GX24Q-4	0.78/0.33	93	>0.90	0
<b>P182H-DVEBSD*</b>	120/277V Electronic	2 32W Triple 4-Pin	GX24Q-4	0.24/0.11	29	>0.90	0
	120/277V Electronic	2 42W Triple 4-Pin	GX24Q-4	0.31/0.13	36	>0.90	0
<b>P183H-DVEB</b>	120/277V Electronic	2 13W Quad 4-Pin	G24Q-1	0.25/0.11	29	>0.90	0
<b>P183H-DVEBSD*</b>	120/277V Electronic	2 13W Quad 4-Pin	G24Q-1	0.25/0.11	29	>0.90	0
<b>P186H-DVEB</b>	120/277V Electronic	2 26W Quad 4-Pin	G24Q-3	0.43/0.19	52	>0.90	50
<b>P186H-DVEBSD*</b>	120/277V Electronic	2 26W Quad 4-Pin	G24Q-3	0.43/0.19	52	>0.90	50
<b>P186H-DM</b>	120 Electronic	2 26W Quad 4-Pin	G24Q-3	0.48	58	>0.90	50
<b>P186H-DMSD*</b>	120 Electronic	2 26W Quad 4-Pin	G24Q-3	0.48	58	>0.90	50
<b>P188H-DVEB</b>	120/277V Electronic	2 18W Quad 4-Pin	G24Q-2	0.30/0.13	35	>0.90	0
<b>P188H-DVEBSD*</b>	120/277V Electronic	2 18W Quad 4-Pin	G24Q-2	0.30/0.13	35	>0.90	0

Use P8100-01 accessory with wide flange (WF) trims. Refer to housing compatibility guide on spec sheet.  
DM dimmable housings are 120V only. Dimmable to 5% with 2-wire switches compatible with Advance Mark X ballasts.  
All Retrofit housings listed above are MTO only. Consult Factory for timing. Normally 2 to 4 week turnaround.  
\* Must use Wide Flange trims.

Use P8100-01 accessory with wide flange (WF) trims. Refer to housing compatibility guide on spec sheet.  
DM dimmable housings are 120V only. Dimmable to 5% with 2-wire switches compatible with Advance Mark X ballasts.  
All Retrofit housings listed above are MTO only.

## TRIMS FOR P182H

9" outside diameter (OD)  
7-3/4" aperture  
Recessed Depth (RD):  
6" (except as indicated)

### Open



**P8115-21A** Clear Alzak®  
**P8115-21AWF** Wide Flange\*  
Regressed Prismatic Lens



**P8115-22A** Gold Alzak®  
**P8115-22AWF** Wide Flange\*  
Regressed Fresnel Lens

### Baffle



**P8114-28** White  
Wall Wash



**P8114-31** Black



**P8116-68** White  
Wet location listed  
RD: 7-1/8"



**P8116-83** White  
Wet location listed  
RD: 7-1/8"



**P8113-21A** Clear Alzak®  
RD: 7-1/8"



**P8113-22A** Gold Alzak®  
RD: 7-1/8"

\*MTO: Wide Flange trims go with SD Housings.

## TRIMS FOR P183H, P188H, P186H

9" outside diameter (OD)  
7-3/4" aperture  
Recessed Depth (RD):  
6" (except as indicated)

### Open



**P8130-21A** Clear Alzak®  
**P8130-21AWF** Wide Flange\*



**P8130-22A** Gold Alzak®  
**P8130-22AWF** Wide Flange\*

### Baffle



**P8131-28** White



**P8131-31** Black



**P8135-68** White  
Wet location listed  
RD: 7-1/8"



**P8132-21** Clear Alzak®  
RD: 7-1/8"

\*MTO: Wide Flange trims go with SD Housings.

# 6" LED FIRE RATED NEW 8071

PRO-OPTIC® FIREBOX®

## HOUSINGS & TRIMS



### P821-FBLED

- IC rated
- Fits into 2" x 10" construction
- CUL and UL listed for wet location when used w/P8071 (sold separately)
- UL classified to maintain fire ratings of 2 hour or less (see spec sheet for ceiling/floor designs)



### P821-FBLED

Ceiling Opening: 6-7/8"

Recessed Depth: 8-9/16"

Plaster Frame: 12-3/8"- 9-9/16"

Pryouts: 1/2" and 3/4"

## P8071 LED TRIMS

(see page 648 for details)



P8071-28/30K9-AC1-L08  
P8071-20/30K9-AC1-L08  
P8071-31/30K9-AC1-L08  
P8071-82/30K9-AC1-L08  
800 lumen



P8071-28/30K9-L10-STR2  
P8071-28/35K9-L10-STR2  
1000 lumen



# 6" FLUORESCENT FIRE RATED

PRO-OPTIC® FIREBOX®

Recessed

## HOUSINGS & TRIMS



Catalog Number	Ballast	Wattage	Lamp Base	Current (Amps)	Line Input (Watts)	Minimum Start Temp
<b>P63-EBFB</b>	120/277V Electronic	2 13w Quad 4-Pin	G24q-1	0.25/0.11	29	0
<b>P66-EBFB</b>	120/277V Electronic	2 26w Quad 4-Pin	G24q-3	0.42/0.21	54	0
<b>P68-EBFB</b>	120/277V Electronic	2 18w Quad 4-Pin	G24q-2	0.35/0.15	42	0

Integral emergency option not available on any Pro-Optic Firebox® housing.  
See page 681 for remote mount battery pack options.  
U.S. Patent #: 6357891, 6254527, 6838618

**P63-EBFB**

**P66-EBFB**

**P68-EBFB**

Ceiling Opening: 6-7/8"

Recessed Depth: 8-9/16"

Plaster Frame: 12-3/8"- 9-9/16"

Pryouts: 1/2" and 3/4"

\*Accessory P8555-01 IC Box required for use in IC rated applications.



Patented

**P63-EBFB, P66-EBFB, P68-EBFB**

- Non-IC rated\*
- Fits into 2" x 10" construction
- UL 1598 and CUL listed for damp locations and through branch wiring
- UL classified to maintain fire ratings of 1 hour or less for UL500 series ceiling/floor designs

## TRIMS FOR P63-EBFB, P66-EBFB, P68-EBFB

7-3/4" outside diameter (OD), except where indicated

6-3/8" aperture

Recessed depth: 5-5/16" except where indicated

**Open Alzak®**



**P8030-21AFB** Clear



**P8030-22AFB** Gold

**Wall Washer Alzak®**



**P8032-21FB** Clear Alzak®

**Open**



**P8030-28FB** White

**Baffle**



**P8031-31FB** Black Baffle  
RD: 5-1/4"



**P8031-28FB** White Baffle  
RD: 5-1/4"

**Regressed Prismatic Lens**



**P8035-68FB** Regressed  
Prismatic  
Wet location listed  
RD: 5-1/2"

**Flush Albalite Lens**



**P8033-60FB** Flush  
Albalite  
Wet location listed  
RD: 5-7/16"

**Regressed Fresnel Lens**



**P8034-83FB**  
Regressed Fresnel  
Wet location listed  
RD: 5-3/4"

**Flush Fresnel Lens**



**P8038-83FB** Flush  
Fresnel  
Wet location listed  
RD: 5-7/16"

# 6" FLUORESCENT FIRE RATED

FIREBOX®

## HOUSINGS & TRIMS



### 2-Hour Fluorescent Firebox



#### P62-FB

Ceiling Opening: 6-7/8"  
Recessed Depth: 8-9/16"  
Plaster Frame: 12-3/8" X 9-9/16"  
Pryouts: 1/2" and 3/4"



#### P62-FB

- Non-IC rated\*
- Air-Tight
- Fits into 2 x 10 construction
- 120/277v HPf ballast
- UL classified to maintain up to a two hour fire rating in UL L500 & G531 fire rated ceiling assemblies
- All trims accept 26w or 32w triple tube or spiral 4-pin CFLs unless stated otherwise
- Includes hardware for mounting to furring channels



Patented

Catalog no: **P62-FB**  
Wattage: 26w or 32w  
Lamp base: GX24q-3, 4-pin  
Lamp type: Triple

Trim No.	Lamp*	Maximum Length of Lamp
<b>P8008,P8096</b>	Progress P7817-01, Sylvania CF26DT	4.8"
<b>P8025</b>	Phillips PLT26, GE F32TBX, Sylvania CF26DT, Progress P7817-01	5.3"
<b>P8052,P8053,P8054</b>	GE F32TBX, Sylvania CF26DT	5.5"
<b>P8060,P8062</b>	Progress P7817-01, Sylvania CF26DT	4.8"
<b>P8066,P8068,P8072</b>	GE F32TBX	5.5"
<b>P8074, P8075</b>	GE F32TBX, Philips PLT32, Sylvania CF32DT	5.9"

\*Partial lamp list of maximum wattages and lengths.  
Consult lamp manufacturers for available lamps with M.O.L. requirements.

U.S. Patent #: 6357891, 6254527, 6838618

Energy Star qualified for 120v only  
\*Accessory P8555-01 IC Box required for use in IC rated applications.

7-3/4" outside diameter, except where indicated. IC trims may be used as non-IC trims with same wattages. All trims accept 26w or 32w triple tube 4-pin CFLs unless stated otherwise.

## TRIMS FOR P62-FB

### Open



**P8074-28** White  
OD: 8-3/4"

### Open Splay



**P8072-28** White

### Step Baffle



**P8066-09** Brushed Nickel



**P8066-28** White  
**P8066-31** Black Baffle



**P8066-20** Antique Bronze

### Wall Washer



**P8052-28** White Baffle

### Baffle



**P8075-28** White  
**P8075-31** Black

### Cone



**P8068-22A** Gold Alzak®  
**P8068-21A** Clear Alza®  
**P8068-28** White

### Cone



**P8053-31** Black

### Dome Shower



**P8025-60** White  
Polycarbonate  
Wet location listed  
OD 8-3/4"

### Albalite - Metal



**P8060-28** White  
Wet location listed  
Metal flange

### Albalite - Plastic



**P8008-60** White  
Wet location listed  
Non-metallic flange

### Drop Opal Shower



**P8096-60** White  
Wet location listed  
Non-metallic flange

### Fresnel



**P8062-28** White  
Wet location listed  
Metal flange



# 6" INCANDESCENT FIRE RATED

FIREBOX®

Recessed

## HOUSINGS & TRIMS



### P821-FB

Ceiling Opening: 6-7/8"  
Recessed Depth: 8-13/16"  
Plaster Frame: 12-3/8" X 9-9/16"  
Pryouts: 1/2" and 3/4"  
Incandescent

### P821-FB

- Non-IC rated\*
- UL-CUL listed for damp location and through branch wiring
- Fits into 2 x 10 construction
- UL Classified to maintain fire ratings of 1 hour or less for UL P200 and P500 series roof/ceiling designs
- UL Classified to maintain fire ratings of 2 hours or less for UL D200, D500, G200, G500, L200 and L500 series floor/ceiling designs
- Acoustically tested to maintain STC Ratings of L500 floor/ceiling assemblies



### P821-FBFC

Ceiling Opening: 6-7/8"  
Recessed Depth: 8-13/16"  
Plaster Frame: 12-3/8" X 9-9/16"  
Pryouts: 1/2" and 3/4"  
Incandescent

### P821-FBFC

- Air-Tight
- Shipped with hardware to install bar hangers to furring channels.
- Non-IC rated; insulation must be kept at least 3" away from housing\*
- Fits into 2 x 10 construction
- UL-CUL listed for damp location and feed through wiring
- UL Classified to maintain fire ratings of 1 hour or less for all UL P500 series fire rated ceiling/floor assemblies
- UL Classified to maintain fire ratings of 2 hours or less in all UL D200, G200, L200, D500, G500 and L500 series fire rated ceiling assemblies.
- Acoustically tested to maintain STC Ratings of L500 floor/ceiling assemblies

firebox®

## TRIMS FOR P821-FB & P821-FBFC

### Step Baffle



**P8066-28** White  
Lamp: 120w BR40, 150w PAR38, 40w A19



**P8066-20** Antique Bronze  
**P8066-31** Black Baffle  
Lamp: 120w BR40, 150w PAR38, 40w A19



**P8066-09** Brushed Nickel  
Lamp: 120w BR40, 150w PAR38, 40w A19

### Pin Hole



**P8065-28** White w/Black Baffle  
Lamp: 75w PAR16, 40w R16, 50w R20/PAR20/ PAR30

### Open



**P8074-28** White  
OD: 8-3/4"  
Lamp: 120w BR40, 150w PAR38

7-3/4" outside diameter (OD), except where indicated.

For complete fixture, order housing with trim.

### Open Splay



**P8072-28** White  
Lamp: 85w BR30, 75w PAR30, 60w A19

### Step Baffle Splay



**P8082-28** White Baffle  
**P8082-31** Black Baffle  
OD: 8-3/4"  
Lamp: 120w BR40, 150w PAR38, 40w A19

### Long Neck Baffle



**P8075-28** White Baffle  
OD: 8-3/4"  
Lamp: 85w BR30, 75w PAR30

### Wall Washer



**P8052-28** White Baffle  
Lamp: 60w A19

### Regressed Eyeball



**P8079-28** White Baffle  
**P8079-31** Black Baffle  
Rotates 358°, tilts 30° max.  
Lamp: 65w BR30, 75w PAR30

### Cone



**P8053-31** Black Alzak®  
Lamp: 120w BR40, 150w PAR38

### Cone



**P8068-22A** Gold Alzak®  
**P8068-21A** Clear Alzak®  
**P8068-28** White  
Lamp: 120w BR40, 150w PAR38

### Baffled Mini Eyeball



**P8077-28** White Baffle  
Rotates 358°, tilts 30° max  
Lamp: 75w R20, PAR20, PAR16

### Regressed Mini Eyeball



**P8078-28** White  
Rotates 358°, tilts 30° max.  
Lamp: 75w R20/PAR20/ PAR16

### Eyeball



**P8076-09** Brushed Nickel  
**P8076-20** Antique Bronze  
**P8076-28** White  
Rotates 358°, tilts 30° max.  
Lamp: 85w BR30, 75w PAR30

### Open Shower Trim



**P8074WL-28** White  
Wet location listed  
Metal flange, OD: 8-3/4"  
Lamp: 75w PAR38\*

### Fresnel



**P8011-60** White  
Wet location listed  
Non-metallic flange  
Lamp: 50w PAR30

### Fresnel Glass



**P8062-28** White  
Wet location listed  
Metal flange  
Lamp: 60w A19

### Albalite Glass



**P8060-28** White  
Wet location listed  
Metal flange  
Lamp: 60w A19

### Drop Opal Shower



**P8009-60** White Glass  
Wet location listed  
Non-metallic flange  
Lamp: 50w PAR30, 60w A19

### Drop Opal Shower



**P8007-60** White Glass  
Wet location listed  
Metal flange. OD: 8-1/4"  
Lamp: 75w A19, 75w PAR30

### Open Shower



**P8072WL-28** White  
Wet location listed  
Metal flange  
Lamp: 50w PAR30\*

### Dome Shower



**P8025-60** White Polycarbonate  
Wet location listed  
OD: 8-3/4"  
Lamp: 60w A19



U.S. Patent #:  
5758959, 6004011, 6357891,  
6254527

Lamp wattages shown are maximum.

For accessories see page 680.

U.S. Patent Nos. 5758959, 6357891,  
6004011

\* WL trims require use with outdoor  
rated PAR lamps

# 5" INCANDESCENT FIRE RATED

## FIREBOX®

### HOUSINGS & TRIMS



#### New Construction Fire Rated Ceilings



**P85-FB**

- **P85-FB**
- Non-IC rated\*
- Fits into 2" x 10" construction
- UL Classified to maintain fire rating of 1 hour or less for UL P200 and P500 series roof/ceiling designs
- UL Classified to maintain fire ratings of 2 hours or less for UL D200, D500, G200, G500, L200 and L500 series floor/ceiling designs

Ceiling Opening: 5-1/4"  
Recessed Depth: 8-13/16"  
Plaster Frame: 8-3/8" x 13"  
Pryouts: 1/2" and 3/4"

\*See page 598 for P8555-01 IC Box to allow use in IC rated applications.



U.S. Patent #:  
5758959, 6004011, 6357891,  
6254527

### TRIMS FOR P85-FB

6-1/8" outside diameter, except where indicated.

#### Eyeball



**P8176-20** Antique Bronze  
**P8176-28** White

#### Step Baffle



**P8175-20** Antique Bronze  
**P8175-31** Black  
Lamp: 65w BR 30, 50w PAR 30



**P8175-28** White  
Lamp: 65w BR 30, 50w PAR 30

#### Open



**P8168-28** White  
Lamp: 65w BR 30, 50w PAR 30 LN

#### Deep Cone



**P8172-09** Brushed Nickel  
Lamp: 65w BR30, 50w PAR30 short neck

#### Alzak®



**P8172-22A** Gold Alzak®  
**P8172-21A** Clear Alzak®  
Lamp: 65w BR30, 50w PAR30 short neck

#### Open Shower




**P8367WL-28** White  
Wet location listed  
Lamp: 50w PAR 30\*

#### Shower Light



**P8109-60** White Glass  
Wet location listed  
Metal flange  
Lamp: 40w A19, 50w PAR30 short neck

\* WL trims require use with outdoor rated PAR lamps

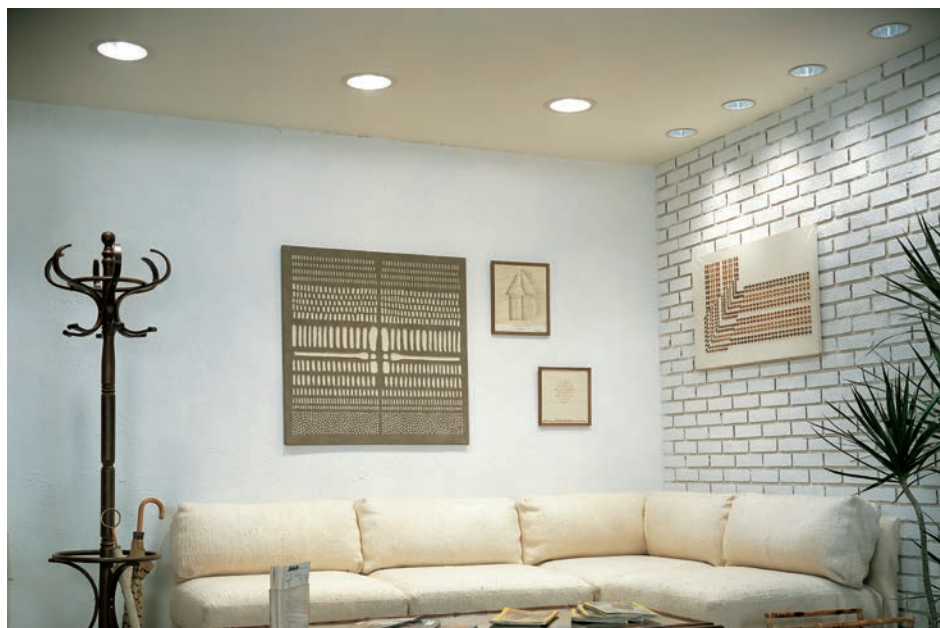

# 4" INCANDESCENT FIRE RATED FIREBOX®

Recessed

## HOUSINGS & TRIMS

### New Construction Fire Rated Ceilings



**P817-FB**

Ceiling Opening: 4-1/2"  
Recessed Depth: 15-3/4" x 9-3/4"  
Plaster Frame: 7-1/2"  
Pryouts: 1/2" and 3/4"

#### P817-FB

- Non-IC rated\*
- Fits Into 2" x 10" construction
- UL-CUL listed for damp location and feed through wiring
- UL Classified to maintain fire ratings of 1 hour or less for UL P200 and P500 series roof/ceiling designs
- UL Classified to maintain fire ratings of 2 hours or less for UL D200, D500, G200, G500, L200 and L500 series floor/ceiling designs

### New Construction Fire Rated Ceilings



**P831-FB**

Ceiling Opening: 4-1/2"  
Recessed Depth: 8-13/16"  
Plaster Frame: 8-3/8" x 13"  
Pryouts: 1/2" and 3/4"

#### P831-FB

- Non-IC rated\*
- Fits Into 2" x 10" construction
- UL-CUL listed for damp location and feed through wiring
- UL Classified to maintain fire ratings of 1 hour or less for UL P200 and P500 series roof/ceiling designs
- UL Classified to maintain fire ratings of 2 hours or less for UL D200, D500, G200, G500, L200 and L500 series floor/ceiling designs



U.S. Patent #:  
5758959, 6004011, 6357891,  
6254527

## 4" LOW VOLTAGE FIREBOX

### TRIMS FOR P817-FB

5" outside diameter. All trims have 360° positioning. Lamps tilt 30° max.

#### Step Baffle



**P8037-28 White**  
**P8037-31 Black**



**P8037-09 Brushed Nickel**  
Lamp: 12V 50w MR-16

#### Eyeball



**P8057-20 Antique Bronze**



**P8057-28 White**  
Rotates 360°, tilts 30°  
Lamp: 12V 50w MR-16

#### Alzak® Cone



**P8056-21 Clear Alzak®**  
Lamp: 12V 50w MR-16

#### Slotted



**P8039-28 White**  
Lamp: 12V 50w MR-16

#### Wall Washer



**P8045-31 Black**  
Lamp: 12V 50w MR-16

#### Pinhole Spot



**P8036-28 White**  
Lamp: 12V 50w MR-16

## 4" LINE VOLTAGE FIREBOX

### TRIMS FOR P831-FB

5" outside diameter. All trims: 360° positioning, tilt 20°.

#### Open



**P8041-28 White**  
**P8041-09 Brushed Nickel**  
Lamp: 55w PAR 16,  
50w PAR 20, R20

#### Step Baffle



**P8044-09 Brushed Nickel**  
**P8044-31 Black**  
**P8044-28 White**  
Lamp: 55w PAR 16,  
50w PAR 20, R20



**P8044-20 Antique Bronze**  
Lamp: 55w PAR 16,  
50w PAR 20, R20

#### Open Shower



**P8041WL-28 White**  
Wet location listed  
Lamp: 50w PAR 20

#### Alzak® Cone



**P8043-21 Clear Alzak®**  
**P8043-22 Gold Alzak®**  
Lamp: 75w PAR 16, R20,  
50w PAR 20

#### Alzak® Cone



**P8048-21 Clear Alzak®**  
Lamp: 75w PAR 16, R20,  
50w PAR 20

#### Alzak® Cone



**P8049-31 Black Alzak®**  
Lamp: 75w PAR 16, R20,  
50w PAR 20

#### Eyeball



**P8046-09 Brushed Nickel**  
**P8046-20 Antique Bronze**  
**P8046-28 White**  
Lamp: 40w PAR 16,  
30w R20

#### Wall Washer



**P8047-31 Black Baffle**  
Lamp: 40w PAR 16,  
30w R20

#### Pinhole Spot



**P8042-28 White**  
Lamp: 40w PAR 16,  
30w R20

# RECESSED ACCESSORIES

## RECESSED ENCLOSURE FOR NON-IC HOUSINGS IN IC APPLICATIONS



### P8555-01 IC Box

Creates a barrier to prevent insulation from making contact with recessed fixtures. For use only with Firebox, Pro-Optic, P816, P830, P85-TG, and P83. For use with any other Progress fixture consult factory.

Dimensions: 24-1/2"W. x 35"Ht.


- Material is Coroplast™, which is made from polypropylene co-polymer resin
- Deflection temperature F(@66psi) = 194 (90C)
- Melting point = 162C, 324F
- Normal temperature performance range = -17F to 160F
- MSDS available upon request

### Application

- Use to create a barrier to keep insulation from making contact with the following type Non-IC rated recessed housings: P60-FB, P62-FB, P821-FB, P821-FBFC, P85-FB, P831-FB, P85-TG, P830-TG, P86-TG, P816-TG
- Requires no insulation on top

All Pro-Optic® housings from Progress Lighting: P63, P66, P68, P69, P8213, P8218, P8226

U.S. Patent #: 6,872,885

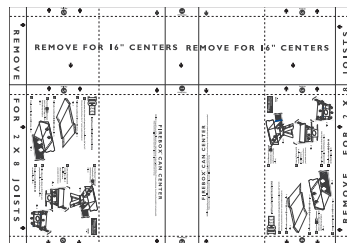

P8555-01 IC Box flat

## RECESSED ACCESSORIES



P8584-01  
P8588-01  
P8587-01  
P8589-01

**P8588-01** 4" ceiling gasket  
**P8584-01** 5" ceiling gasket  
**P8587-01** 6" ceiling gasket  
**P8589-01** 8" ceiling gasket  
Ceiling gasket seals housing to drywall opening for Washington State Energy Code compliance.



P8773-01

**P8773-01** Four mounting clips and screws for T-Bar ceilings for any new construction recessed product using bar hangers.



 
P8585-01

**P8585-01** Goof Ring OD 8-7/8".  
For use with any recessed trim with a 7-3/4" OD.



P8700-01

**P8700-01** Four plaster frame clips and screws for complete squares and rounds.



P8607-01

**P8607-01** Remodel Clips  
Three plaster frame clips for use in new construction frames in finished ceilings.



P8511-01

**P8511-01** Furring channel mounting clip for bar hangers.



P8716-01

**P8716-01** Adjustable hangers  
Two 26" adjustable hangers for step lights, complete rounds and squares.



P8593-01

**P8593-01** Airtight Gasket Kit to convert the P86-TG, P186-TG P183-26EB to an air tight unit. When not using caulk at the ceiling line, P8587-01 may also be required.

## EMERGENCY BATTERY PACK



Emergency battery packs for remote mounting. Can be used with any compact fluorescent fixture. Remote battery must be located within 50 feet of ballast, or 1/2 the recommended distance specified by the AC Ballast manufacturer, whichever is less. Comes with test switch, indicator light, junction box and 4ft of flex.

Cat. No.	Watts	Lamp	Length	Width	Height
<b>P8643-01</b>	10-42W	4 pin Quad, Triple, 2D and twins	9-1/2"	2-3/8"	1-1/2"

## TRIM RING ACCESSORY

### P8100-01

6" Trim Ring Accessory for Retrofit wide flange (WF) trims

### P8101-01

8" Trim Ring Accessory for Retrofit wide flange (WF) trims

## BAR HANGARS

### P8725-01

Bar Hangar for T-Bar. For use with P8200/8201/P82002/P8203

### P8739-01

Bar Hangar for joist. For use with P8200/8201/P82002/P8203


## SPECIALTY RECESSED HOUSINGS AND TRIMS



P6917-TG



P6952-16TG

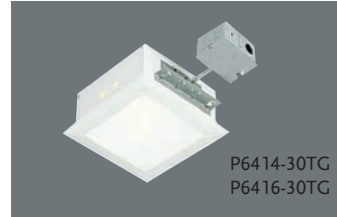

P6414-30TG  
P6416-30TG

### COMPLETE ROUND

Unwired unit: White trim, housing, plaster frame, clips and 4-1/2 feet of wire. All are UL listed for damp locations. Thermo-Gard™ automatic resetting thermal protection.

Cat. No.	<b>P6917-TG</b>
Desc.	Open trim, unwired
Finish	White
Plaster Frame	6-5/8" sq.
Recess Depth	5-3/4"
Ceiling Opening	4-1/2"
Trim O.D.	5-7/8"
Lamp	45w BR 30, 50w PAR 30

### BATH

Complete with housing, trim and 26" adjustable bar hangers. Thermo-Gard™ automatic resetting thermal protection. Junction box has riveted ground, 9 K.O.'s. UL listed for damp locations. Thru-branch wiring, 4 in, 4 out.

Cat. No.	<b>P6952-16TG</b>
Desc.	Heater light
Finish	Satin aluminum
Plaster Frame	8-3/8" x 13"
Recess Depth	7-3/4"
Ceiling Opening	6-7/8"
Trim O.D.	7-3/4"
Lamp	250w R 40

### COMPLETE SQUARE

Complete with housing and trim. Flat white glass. Torsion springs for easy relamping. UL listed for damp locations. Thermo-Gard™ automatic resetting thermal protection.

Cat. No.	<b>P6414-30TG</b>	<b>P6416-30TG</b>
Desc.	Pre-wired	White
Finish	Pre-wired	White
Recess Depth	4-1/4"	4-1/4"
Ceiling Opening	8-1/8"	10-1/8"
Trim (Sq.)	9-1/2"	11-1/2"
Lamp	100w	150w

 
### ACCESSORY

P8700-01 four clips for finished or suspended ceiling installation. P8716-01 accessory bar hangers for new construction. For use with complete squares (P6914, P6416) and complete rounds (P6917).



# STEPS, CORRIDORS AND WALLS

## BRICK LIGHTS - OUTDOOR & INDOOR



### Lighting for safety in traffic areas, indoors and outdoors.


Cast aluminum housing with black metal louver. Three 1/2" I.P. conduit entries. Measures 7-3/4" x 2-1/2" x 3-1/8". For brick, masonry, and poured concrete installations. UL listed for wet locations.

**P6802-31** Black .  
Lamp: One 7w compact fluorescent lamp.



**P6803-30** White  
**P6803-31** Black  
Therma-Gard protection.  
Lamp: One 120V T6-1/2 25w intermediate base.

**P6805-31** Black  
Lamp: One 120v 13w 2pin twin CFL GX23 base.

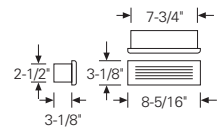

## INDOOR & PROTECTED OUTDOOR



Spring-held white louver faceplate. Metal housing has 1/2" I.P. conduit entry. For indoor and protected outdoor use. UL listed for damp locations. Sheet rock or dry wall installations.


**P6820-30TC\*** White  
Therma-Gard protection. Porcelain socket. Lamp: One 60w A19

**P6820-31TC\*** Black  
Therma-Gard protection. Porcelain socket. Lamp: One 60w A19

**P6821-30\*** White  
Standard 120V NPF ballast.  
Lamp: One 7w or 9w twin CFL lamp.



**P6826-30\*** White  
Compact fluorescent.  
Same as P6821-30 except with a shatter-resistant white acrylic faceplate.  
Lamp: One 7w or 9w twin CFL lamp.

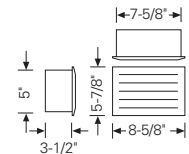

## THRU-WALL DOUBLE FACE




One metal housing with two shatter-resistant white acrylic faceplates for both sides of a stud wall, 3-1/2" to 4-1/2" thick. White trim. Reduces costs by illuminating two areas with one fluorescent light. For indoor and protected outdoor use. UL listed for damp locations. Sheet rock or dry wall installations.

**P6824-30\*** White  
Compact fluorescent.  
Lamp: One 7w or 9w twin CFL lamp.



**P6825-30\*** White  
Same as P6824-30 except with two louver faceplates.  
Lamp: One 7w or 9w twin CFL lamp.

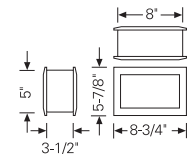

## INDOOR & OUTDOOR



P6816-16



P6818-16

Cast aluminum, porcelain socket, reflector, tempered glass. Two 1/2" I.P. for conduit entry. For poured concrete and masonry installations only. UL listed for wet locations.

**P6816-16** Satin Aluminum  
White glass face.  
Lamp: One 25w A-19.


**P6818-16** Satin Aluminum  
White glass face.  
Lamp: One 75w A-19.

**P6817-16** Satin Aluminum  
Louver faceplate over glass.  
Lamp: One 25w A-19.


**P6817-31** Black  
Louver faceplate over glass.  
Lamp: One 25w A-19.

**P6819-16** Satin Aluminum  
Louver faceplate over glass.  
Lamp: One 75w A-19.


**P6816-16 & P6817-16,31**

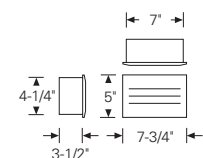

**P6818-16 & P6819-16**

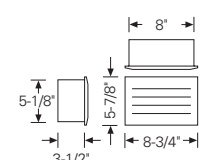

P6817-31

 

P6819-16

\* Requires accessory bar hanger kit, P8716-01 for installation to wood studs.

progresslighting.com

## LED STEP & WALL LIGHTS

**P6827** and **P6828** LED step/wall lights are available in a vertical or horizontal configuration for mounting into a single-gang wallbox

- cCSAus listed for wet locations
- Integral power supply module in a compact package
- Consumes less than 5w of power per fixture
- Warm white 3000K LED's included
- CRI: 84+
- Beam spread: 120 degrees



P6827-0930K



P6827-3030K



P6828-0930K




P6828-3030K

Product No.	Finish	Description	Size	Lamp
<b>P6827-0930K</b>	Brushed Nickel	Mini horizontal step/	4-13/16" W.	4w LED, included.
<b>P6827-3030K</b>	White	wall light	3" ht.	
<b>P6828-0930K</b>	Brushed Nickel	Mini vertical step/	3" W.	4w LED, included.
<b>P6828-3030K</b>	White	wall light	4-13/16" ht.	

**P6829** and **P6832** LED step/wall lights provide an attractive solution for a variety of illumination tasks

- cCSAus listed for outdoor as well as indoor applications
- Integral power supply module in a compact package
- Consumes less than 4w of power per fixture
- Warm white 3000K LED's included
- CRI: 84+
- Beam spread: 120 degrees

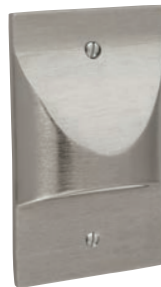

P6829-0930K



P6829-2030K



P6829-3030K



P6829-3130K



P6832-0930K



P6832-3130K

Product No.	Finish	Description	Size	Lamp
<b>P6829-0930K</b>	Brushed Nickel	Mini vertical step/	3" W.	4w LED, included.
<b>P6829-2030K</b>	Antique Bronze	wall light	4-3/4" ht.	
<b>P6829-3030K</b>	White			
<b>P6829-3130K</b>	Black			
Product No.	Finish	Description	Size	Lamp
<b>P6832-0930K</b>	Brushed Nickel	Mini vertical step/	4-3/4" W.	4w LED, included.
<b>P6832-2030K</b>	Antique Bronze	wall light	3" ht.	
<b>P6832-3030K</b>	White			
<b>P6832-3130K</b>	Black			

U.S. Patent #.  
6357891, 5379199

## LED Exit / Emergency

ENERGY SAVING EMERGENCY LED EXIT SIGNS.

**PE008-30** White with Red Letters

**PE009-30** White with Green Letters

Size: 11-1/2" W., 7-1/8" ht. Extends 2".

Features: Universal face, LED life-cycle of more than 10 years, molded-in template for quick installation, dual-voltage 120 or 277V AC input, includes long-life Nickel Cadmium battery for UL recognized 90 minutes emergency lighting, damp location listed, provided with test switch and AC-on indicator, canopy included. 2 year full unit warranty.

**PE010-30** White with Red Letters

**PE011-30** White with Green Letters

Size: 18" W., 7-1/8" ht. Extends 4-1/3".

Features: Combination Exit/Emergency Light, universal face, LED life-cycle of more than 10 years, molded-in template for quick installation, dual-voltage 120 or 277V AC input, includes long-life Nickel Cadmium battery for UL recognized 90 minutes emergency lighting, damp location listed, provided with test switch and AC-on indicator, lamp-heads are fully adjustable, canopy included.

**PE012-30** White

Size: 9" W., 4" ht. Extends 2-3/4".

Features: Dual LED head emergency light, LED life-cycle of more than 10 years, quick installation, dual-voltage 120 or 277V AC input, 3 VDC, 1 W Lamp, includes long-life Nickel Cadmium battery for UL recognized 90 minutes emergency lighting, damp location listed, fully adjustable lamp-heads, provided with test switch and AC-on indicator.



PE008-30



PE009-30



PE010-30



PE012-30

# Lamps

## Compact Fluorescent Lamps



**MLS13GUWW**  
13w self-ballasted CFL  
lamp. GU24 base.



**MLS26GUWW**  
26w self-ballasted CFL  
lamp. GU24 base.



**MLS18GUWW**  
18w self-ballasted CFL  
lamp. GU24 base.



## Halogen Lamps



**P7829-01**  
35w MR11 GU4  
MFL lamp, 12v.



**P7831-01**  
50w MR16 GU5.3  
MFL lamp, 12v.



**P7833-01**  
50w GU10  
MFL lamp, 120v.



**P7834-01\***  
50w GU10 MFL  
coated lamp, 120v.



**P7802-01** 20w G4  
halogen, 12-volt.



**P7805-01** 50w mini  
candelabra halogen,  
120 volt.

**P7830-01\***  
35w MR11 GU4  
MFL coated lamp, 12v.

**P7832-01\***  
50w MR16 GU5.3  
MFL coated lamp, 12v.

\* Coated lamp  
eliminates pink color  
behind lamp.

## Xenon Lamps



**P7807-01**  
60w krypton  
replacement lamp  
60w Krypton,  
120-volt.  
E12 (candelabra)

## Halogen Lamps



**P7812-01**  
35w G9 halogen,  
120-volt.



**P7818-01**  
6-pack of 60w G9  
halogen, 120-volt.

## Landscape Lamp



**P7801-01** 18w T5 wedge  
base lamp, 12-volt.

# INDOOR FAMILY INDEX

## Alexa



P2851 ..... 320  
P2959 ..... 179,422  
P2977 ..... 422  
P2978 ..... 422  
P2998 ..... 422  
P3846 ..... 181  
P3977 ..... 178  
P4458 ..... 179  
P4459 ..... 179  
P4619 ..... 181  
P4626 ..... 180  
P5147 ..... 179,287

## Americana



P3801 ..... 248  
P3802 ..... 248  
P4346 ..... 247  
P4354 ..... 247  
P4355 ..... 246  
P4356 ..... 246  
P4357 ..... 248  
P4358 ..... 248  
P4359 ..... 248

## Applause



P2095 ..... 107,397  
P2096 ..... 397  
P2097 ..... 397  
P3507 ..... 107,309  
P3560 ..... 106  
P4035 ..... 106  
P4036 ..... 106  
P4037 ..... 107  
P5010 ..... 107,266

## Archie



P2989 ..... 386  
P2991 ..... 386  
P2992 ..... 387  
P2997 ..... 387  
P3740 ..... 316  
P4624 ..... 157  
P4688 ..... 155  
P4689 ..... 154  
P4690 ..... 157  
P5026 ..... 154,278  
P5173 ..... 155,278

## Arts & Crafts



P2900 ..... 115  
P3002 ..... 401,492  
P3003 ..... 401  
P3004 ..... 401  
P3005 ..... 401  
P3513 ..... 310  
P3613 ..... 115  
P4100 ..... 115  
P4102 ..... 115  
P5020 ..... 114,272  
P5272 ..... 550,634  
P5428 ..... 560  
P5528 ..... 560  
P5628 ..... 551  
P5629 ..... 551  
P7138 ..... 401,492

## Ashbury



P2843 ..... 68  
P2885 ..... 381  
P2886 ..... 381  
P2887 ..... 381  
P2888 ..... 381  
P3886 ..... 307  
P3932 ..... 71  
P4349 ..... 70  
P4462 ..... 69  
P4463 ..... 72  
P4464 ..... 73  
P5054 ..... 71,266  
P5056 ..... 70,266

## Avalon



P3153 ..... 449  
P3154 ..... 449  
P3155 ..... 449  
P3156 ..... 449  
P3266 ..... 218,449  
P3267 ..... 449  
P3268 ..... 449  
P3269 ..... 449  
P3467 ..... 218,327  
P3468 ..... 218  
P3773 ..... 218  
P3785 ..... 219  
P4057 ..... 217  
P4067 ..... 216  
P4068 ..... 217  
P4069 ..... 219  
P4070 ..... 216  
P4275 ..... 217  
P4276 ..... 216  
P5068 ..... 216,289  
P5145 ..... 216,289

## Bay Court



P3701 ..... 63  
P3941 ..... 305,571  
P3942 ..... 305,571  
P5499 ..... 571  
P5589 ..... 62,570  
P5849 ..... 570  
P5851 ..... 571

## Bedford



P3187 ..... 456  
P3188 ..... 456  
P3367 ..... 244,456  
P3368 ..... 456  
P3369 ..... 456  
P3788 ..... 244,326  
P4390 ..... 244  
P4391 ..... 245  
P5090 ..... 245,295

## Bingo



P2026 ..... 317,489  
P3695 ..... 339,467  
P3737 ..... 466  
P3741 ..... 317  
P3747 ..... 339,466  
P3756 ..... 339,467  
P3956 ..... 339  
P5014 ..... 260  
P5314 ..... 260  
P7056 ..... 489



## Bliss



P2139 ..... 87,396  
P2141 ..... 396  
P4032 ..... 87  
P4038 ..... 87  
P5165 ..... 87

## Bravo



P2004 ..... 444  
P2005 ..... 444  
P2006 ..... 444  
P2007 ..... 444  
P2016 ..... 444  
P3821 ..... 193  
P3912 ..... 189  
P3969 ..... 190  
P4621 ..... 191  
P4622 ..... 189  
P4623 ..... 193  
P4625 ..... 190  
P4687 ..... 190  
P5300 ..... 192,288

## Calven



P3209 ..... 166,420  
P3210 ..... 420  
P3223 ..... 420  
P3236 ..... 420  
P3878 ..... 168,319  
P4537 ..... 169  
P4539 ..... 166  
P5118 ..... 168,276

## Cantata



P3216 ..... 140,404  
P3222 ..... 404  
P3248 ..... 404  
P3249 ..... 404  
P3440 ..... 141,312  
P3814 ..... 141  
P3853 ..... 312  
P4005 ..... 138  
P4006 ..... 140  
P4039 ..... 142  
P4040 ..... 143  
P5139 ..... 138,274

## Caress



P3076 ..... 377  
P3077 ..... 377  
P3078 ..... 377  
P3434 ..... 302  
P3682 ..... 25  
P3946 ..... 24  
P3947 ..... 24  
P4644 ..... 23  
P4645 ..... 23  
P4646 ..... 25  
P4685 ..... 22  
P5044 ..... 24,263,302  
P5306 ..... 23  
P7046 ..... 22,377,488

## Clayton



P2849 ..... 77  
P3759 ..... 307  
P3909 ..... 74,268  
P4400 ..... 77  
P4421 ..... 76  
P4422 ..... 75  
P5256 ..... 75,268

## Club



P2055 ..... 91  
P3615 ..... 90,308  
P3625 ..... 88  
P3626 ..... 90  
P4527 ..... 88  
P4528 ..... 88  
P4529 ..... 89  
P4552 ..... 91  
P5039 ..... 90,271

## Compass



P2046 ..... 65,382  
P2047 ..... 382  
P2048 ..... 382  
P2049 ..... 382  
P3552 ..... 66  
P3614 ..... 321  
P3629 ..... 66  
P4705 ..... 67  
P4706 ..... 65  
P4707 ..... 64  
P4708 ..... 67  
P5016 ..... 64,267

## Crestwood



P3902 ..... 61  
P3903 ..... 61  
P3904 ..... 61

## Dazzle



P2050 ..... 16  
P3572 ..... 16,302  
P3574 ..... 16  
P3576 ..... 16  
P4523 ..... 14  
P4524 ..... 14  
P4525 ..... 16  
P4526 ..... 16  
P5017 ..... 14,261

## Eclipse



P3480 ..... 340	P3564 ..... 340	P7320 ..... 341
P3481 ..... 340	P3567 ..... 341	P7322 ..... 254
P3482 ..... 340	P3568 ..... 341	P7323 ..... 255
P3483 ..... 341	P3569 ..... 341	P7324 ..... 340
P3484 ..... 341	P3570 ..... 341	P7325 ..... 340
P3485 ..... 341	P3573 ..... 254	P7326 ..... 340
P3486 ..... 254	P3575 ..... 255	P7327 ..... 341
P3487 ..... 255	P7170 ..... 494	P7328 ..... 341
P3489 ..... 340	P7171 ..... 494	P7329 ..... 341
P3491 ..... 340	P7175 ..... 494	
P3492 ..... 341	P7176 ..... 494	
P3561 ..... 340	P7315 ..... 340	
P3562 ..... 340	P7316 ..... 340	
P3563 ..... 340	P7319 ..... 341	

## Elina



P2099 ..... 12,376  
P2100 ..... 376  
P4651 ..... 104  
P4652 ..... 13

## Equinox



P3791 ..... 57  
P3827 ..... 59  
P3889 ..... 59  
P3940 ..... 58  
P5142 ..... 57,265  
P7077 ..... 58,265  
P7078 ..... 58  
P7086 ..... 58

## Fiorentino



P2879 ..... 92  
P2951 ..... 92  
P3815 ..... 308  
P4409 ..... 93  
P4410 ..... 93  
P4411 ..... 92  
P5140 ..... 93,270

# INDOOR FAMILY INDEX

## Flourish



P4803 ..... 112  
P4805 ..... 112  
P5151 ..... 113  
P7142 ..... 113

## Fortune



P2920 ..... 380  
P2927 ..... 380  
P3970 ..... 304  
P4673 ..... 47  
P4674 ..... 47  
P4675 ..... 46  
P5007 ..... 46,264  
P5034 ..... 46,264  
P7049 ..... 47,380

## Gather



P2650 ..... 365  
P2658 ..... 371  
P2706 ..... 452  
P2707 ..... 453  
P2708 ..... 452  
P2709 ..... 453  
P2713 ..... 452  
P2714 ..... 452  
P3914 ..... 238  
P3928 ..... 236  
P3929 ..... 239  
P4440 ..... 237  
P4441 ..... 237  
P4627 ..... 238  
P5113 ..... 239,293

## Glendale



P3780 ..... 322  
P3781 ..... 202  
P4082 ..... 203  
P4083 ..... 203  
P4085 ..... 202  
P4086 ..... 203

## Greyson




P3577 ..... 101  
P4709 ..... 100  
P4710 ..... 101  
P4711 ..... 100  
P7158 ..... 101

## Harmony



P3529 ..... 50,306  
P3530 ..... 50,306  
P3531 ..... 50,306  
P3557 ..... 52,306  
P3558 ..... 52,306  
P3559 ..... 52,306  
P4491 ..... 52

## Haven

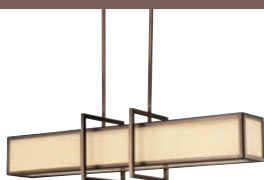

P3898 ..... 78  
P3921 ..... 78

## Heart



P2913 ..... 448  
P2915 ..... 448  
P2919 ..... 448  
P2928 ..... 448  
P3955 ..... 241  
P4664 ..... 240  
P4666 ..... 241  
P4668 ..... 242  
P4686 ..... 243  
P5131 ..... 240

## Helium



P2901 ..... 81,413  
P2905 ..... 413  
P4185 ..... 81

## Identity



P4713 ..... 27  
P4714 ..... 27  
P7155 ..... 27  
P8930 ..... 27,298  
P8931 ..... 27,298

## Indulge



P3101 ..... 383  
P3102 ..... 383  
P3103 ..... 383  
P3104 ..... 383  
P3105 ..... 383  
P3707 ..... 304  
P3820 ..... 49  
P4088 ..... 48  
P4089 ..... 48  
P4090 ..... 48  
P4188 ..... 49  
P5171 ..... 49,263

## Inspire



P2018 ..... 447  
P2019 ..... 447  
P2020 ..... 447  
P2021 ..... 447  
P3799 ..... 234  
P3931 ..... 234  
P3939 ..... 325  
P4632 ..... 232  
P4635 ..... 233  
P4638 ..... 231  
P4650 ..... 234  
P5065 ..... 232,290  
P7026 ..... 235,490

## Invite



P2041 ..... 158,409  
P2078 ..... 408  
P2079 ..... 408  
P2080 ..... 409  
P2081 ..... 409  
P3693 ..... 316  
P3694 ..... 316,467  
P4695 ..... 160  
P4696 ..... 160  
P4697 ..... 158  
P5046 ..... 161  
P5047 ..... 161  
P5110 ..... 161,276

## Joy



P2000 ..... 436  
P2001 ..... 436  
P2002 ..... 436  
P2003 ..... 436  
P3587 ..... 187  
P3951 ..... 186  
P4014 ..... 185,192  
P4489 ..... 187  
P4490 ..... 183  
P4492 ..... 184  
P4497 ..... 185  
P5270 ..... 186,288

## Kensington



P2656 ..... 366  
P2783 ..... 123,406  
P2784 ..... 406  
P2785 ..... 407  
P2786 ..... 407  
P3464 ..... 120  
P3532 ..... 124  
P3678 ..... 125,313  
P3829 ..... 313  
P3986 ..... 313  
P4158 ..... 125  
P4238 ..... 121  
P4288 ..... 123  
P4314 ..... 122  
P5141 ..... 124,273

## Le Jardin



P2841 ..... 103,311  
P2967 ..... 402  
P2968 ..... 402  
P2969 ..... 402  
P3012 ..... 103,402  
P3598 ..... 311  
P3684 ..... 104  
P3686 ..... 104  
P4147 ..... 105  
P4200 ..... 103  
P4201 ..... 102  
P4202 ..... 103  
P4203 ..... 104  
P5083 ..... 105,271  
P5122 ..... 105,271

## Legend



P2087 ..... 133,398  
P2088 ..... 398  
P2089 ..... 399  
P2090 ..... 399  
P2315 ..... 133,313  
P3505 ..... 135  
P4270 ..... 133  
P4271 ..... 132  
P4272 ..... 134  
P5032 ..... 134,274

## Madison



P2623 ..... 366  
P3161 ..... 440,220  
P3162 ..... 440  
P3163 ..... 440  
P3164 ..... 440  
P3311 ..... 325  
P3312 ..... 325  
P3663 ..... 325  
P3792 ..... 220  
P3793 ..... 221  
P3794 ..... 220  
P4280 ..... 222  
P4281 ..... 222  
P4282 ..... 223  
P4283 ..... 221  
P5078 ..... 221,286  
P5079 ..... 223,286

## Markor



P5198 ..... 257  
P5199 ..... 257  
P8766 ..... 257  
P8768 ..... 256  
P8820 ..... 256  
P8821 ..... 256  
P8822 ..... 257  
P8823 ..... 257  
P8824 ..... 256  
P8825 ..... 256  
P8928 ..... 256

## Melbourne



P2918 ..... 111,395  
P3022 ..... 395  
P3023 ..... 395  
P3024 ..... 395  
P3606 ..... 111  
P3641 ..... 312  
P3717 ..... 312  
P3718 ..... 110,312  
P3885 ..... 312  
P4055 ..... 110  
P4059 ..... 110  
P4060 ..... 108  
P4061 ..... 108  
P4266 ..... 110  
P4268 ..... 108  
P5000 ..... 111,272  
P5001 ..... 111,272

## Merge



P3446 ..... 138  
P4315 ..... 138  
P4316 ..... 138  
P4317 ..... 139  
P5055 ..... 139,275

## Mingle



P3565 ..... 308  
P5038 ..... 82,269  
P5155 ..... 82,269  
P5156 ..... 82,269

## Nissé



P2012 ..... 378  
P2013 ..... 378  
P2014 ..... 378  
P2015 ..... 378  
P2933 ..... 29  
P3881 ..... 33,262,302  
P4062 ..... 33  
P4139 ..... 31  
P4431 ..... 31  
P4538 ..... 31  
P4629 ..... 31  
P4630 ..... 33  
P5019 ..... 28,262  
P5105 ..... 33,262

## Noir



P2729 ..... 42  
P3400 ..... 45,303  
P4208 ..... 41  
P4209 ..... 43  
P4210 ..... 45

## North Park



P2531 ..... 354  
P2654 ..... 365  
P2733 ..... 432  
P2738 ..... 432  
P2743 ..... 432  
P2745 ..... 432  
P3597 ..... 201,322  
P3852 ..... 322  
P3854 ..... 322  
P3906 ..... 201  
P4001 ..... 200  
P4002 ..... 199  
P4003 ..... 200  
P4004 ..... 199  
P4053 ..... 198  
P5135 ..... 201,286

## Orbitz



P3030 ..... 424  
P3057 ..... 424  
P3058 ..... 424  
P3954 ..... 164,317  
P4659 ..... 162  
P4660 ..... 164  
P4661 ..... 162  
P4662 ..... 164  
P4663 ..... 165  
P5114 ..... 165,275

# INDOOR FAMILY INDEX

## Pavilion



P3265 ..... 204,433  
P3270 ..... 433  
P3294 ..... 433  
P3325 ..... 205  
P3478 ..... 321  
P3479 ..... 321  
P3738 ..... 321  
P4579 ..... 205  
P4580 ..... 205  
P4592 ..... 207  
P4603 ..... 207  
P4604 ..... 206  
P5084 ..... 204,290  
P5125 ..... 206,290

## Piedmont



P3884 ..... 60  
P3888 ..... 60

## Rave



P2070 ..... 421  
P2071 ..... 421  
P2072 ..... 421  
P2073 ..... 421  
P3550 ..... 319  
P3944 ..... 177  
P4641 ..... 177  
P4642 ..... 177  
P4643 ..... 177  
P5128 ..... 176,293

## Renovations



P2625 ..... 366  
P2730 ..... 389  
P2731 ..... 389  
P2732 ..... 389  
P3016 ..... 144,389  
P3515 ..... 315  
P3607 ..... 145,315  
P3608 ..... 148  
P3772 ..... 315  
P4113 ..... 146  
P4114 ..... 148  
P4115 ..... 145  
P4116 ..... 146

## Replay



P4509 ..... 147  
P4510 ..... 149  
P5104 ..... 147,274  
P7122 ..... 144,490  
P2131 ..... 197  
P3423 ..... 320  
P3424 ..... 320  
P3450 ..... 197  
P4318 ..... 197  
P4319 ..... 195  
P5162 ..... 195  
P5170 ..... 195

## Revive



P2074 ..... 150,388  
P2075 ..... 388  
P2076 ..... 388  
P2077 ..... 388  
P3971 ..... 151  
P4227 ..... 150  
P4228 ..... 152  
P4234 ..... 150  
P4235 ..... 151  
P4236 ..... 153  
P5148 ..... 153,275

## Riverside



P2651 ..... 364  
P3092 ..... 116,400  
P3093 ..... 400  
P3094 ..... 400  
P3095 ..... 400  
P3519 ..... 119  
P3525 ..... 311  
P4212 ..... 117  
P4213 ..... 118  
P4214 ..... 117  
P4229 ..... 118  
P4245 ..... 119  
P5002 ..... 116,272

## Roxbury



P2724 ..... 38,379  
P2726 ..... 36,379  
P2727 ..... 379  
P2728 ..... 379  
P2772 ..... 34  
P2816 ..... 34  
P2817 ..... 39,303  
P2819 ..... 303  
P4500 ..... 35  
P4501 ..... 36  
P4502 ..... 36  
P4503 ..... 37  
P4504 ..... 37  
P4505 ..... 39  
P4506 ..... 37  
P4507 ..... 39  
P4508 ..... 38  
P5100 ..... 39,264  
P8670 ..... 300  
P8701 ..... 298  
P8702 ..... 298  
P8703 ..... 298  
P8704 ..... 298

## Santiago



P2752 ..... 94,394  
P2753 ..... 99,394  
P2754 ..... 394  
P3837 ..... 310  
P3839 ..... 98  
P3840 ..... 98  
P4179 ..... 99  
P4586 ..... 96  
P4587 ..... 95  
P4588 ..... 96  
P5076 ..... 97,270

## Savannah



P3204	.....213,437	P4120	..... 212
P3205	..... 437	P4121	..... 214
P3206	..... 437	P4122	..... 215
P3207	..... 437	P5040	.....214,289
P3539	..... 324	P7210	.....212,491
P3540	..... 324		
P3541	..... 324		
P3542	..... 215		
P4007	..... 214		
P4010	..... 212		

## Spirit



P2135	..... 439	P4559	..... 210
P2136	..... 439	P4605	..... 208
P2137	..... 439	P4611	..... 209
P2138	..... 439	P5160	.....210,289
P3414	..... 323	P7184	.....211,491
P3455	..... 208		
P3500	..... 323		
P3501	..... 323		
P3502	..... 323		
P3506	..... 323		
P4558	..... 211		

## Status



P2060	..... 21
P3495	..... 303
P3661	..... 21
P3680	..... 18
P4138	..... 20
P4140	..... 18
P4141	..... 18
P4142	..... 19
P5031	.....20,262

## Stroll



P2132	.....84,396
P2133	..... 396
P2134	..... 396
P2312	.....85,309
P3403	..... 84
P4249	..... 84
P4250	..... 85
P5033	.....85,266

## Swing



P3452	..... 54
P4742	..... 54
P4744	..... 54

## The Pointe



P2098	..... 376
P5043	.....8,261
P5051	.....11,261
P5123	..... 10
P5154	..... 10
P5157	..... 11
P5185	..... 8
P5192	..... 8
P7134	.....8,376

## Torino



P2645	..... 364
P2881	.....127,403
P2882	..... 403
P2883	..... 403
P2884	..... 403
P3184	..... 314
P3824	..... 128
P3843	.....128,314
P3847	..... 131
P4405	..... 128
P4415	..... 129
P4416	..... 127
P4417	..... 129
P4418	..... 131
P4419	..... 130
P5144	.....126,273,314
P5153	.....126,273
P7181	.....127,491

## Trinity



P2628	..... 367
P3190	.....226,442
P3191	..... 442
P3192	..... 443
P3193	..... 443
P3473	.....229,326
P3474	.....225,326
P3475	..... 326
P3476	..... 326
P3477	..... 326
P3806	..... 224
P3807	..... 224
P4324	..... 226
P4325	..... 227
P4326	..... 225
P4327	..... 227
P4328	..... 226
P4329	..... 229
P4365	..... 228
P5095	.....228,291
P5096	.....229,291

## Wisten



P2649	..... 365
P2794	.....174,423
P2795	..... 423
P2796	..... 423
P2797	..... 423
P3290	..... 319
P3360	..... 501
P3361	..... 501
P3362	..... 501
P3363	..... 501
P3509	.....173,309
P3510	..... 173
P3757	..... 175
P4434	..... 175
P4435	..... 174
P4436	..... 170
P4439	..... 170
P5108	.....172,277
P5112	.....172,277
P5167	.....172,277



# BATH & VANITY INDEX

Academy 392 Addison 428 Adorn 450 Alabaster Glass 454 Alexa 422 Applause 397



Arch 410 Archie 386 Arise 419 Arts & Crafts 401 Ashbury 381 Avalon 449



Balance 412 Bedford 456 Bliss 396 Bounty 425 Bravo 444 Calven 420



Cantata 404 Caress 377 Cliche 393 Compass 382 Draper 384 Elina 376



Engage 418 Etched Glass 456 Fairfield 434 Fluted Glass 457 Fortune 304 Gather 452



Glenmont 431 Heart 448 Helium 413 Indulge 383 Inspire 447 Invite 408



Joy 436 Kensington 406 Lahara 426 Le Jardin 402 Legend 398 Lucky 385



Lynzie 417 Madison 440 Melbourne 395 Nisse 378 North Park 365 Oasis 435



Orbitz 424 Pavilion 433 Rave 421 Reign 393 Revive 388 Renovations 389



Riverside 400 Rizu 416 Roxbury 379 Santiago 394 Savannah 437 Spirit 439



Streaming 414 Stroll 396 Sync 415 The Pointe 376 Torino 403 Trinity 443



Victorian 391 Wisten 423



# WALL BRACKET INDEX

Academy 392 Addison 428 Adorn 450 Alabaster Glass 454 Alexa 178 Americana 248



Applause 107 Arch 410 Archie 396 Arise 419 Arts & Crafts 115 Ashbury 65



Avalon 218 Balance 412 Bedford 244 Bliss 87 Bravo 444 Calven 166



Cantata 140 Caress 22 Clayton 77 Club 91 Compass 65 Dazzle 16



Draper 384 Elina 12 Engage 418 Etched Glass 456 Fairfield 434 Fiorentino 92



Flourish 112 Fluted Glass 457 Fortune 47 Gather 452 Glenmont 430 Greyson 101



Heart	448	Identity	27	Indulge	383	Inspire	447	Invite	158	Joy	436
-------	-----	----------	----	---------	-----	---------	-----	--------	-----	-----	-----



Kensington	123	Lahara	426	Legend	133	Le Jardin	103	Lucky	385	Lynzie	417
------------	-----	--------	-----	--------	-----	-----------	-----	-------	-----	--------	-----



Madison	220	Melbourne	111	Nisse	29	Noir	42	North Park	432	Opal Glass	457
---------	-----	-----------	-----	-------	----	------	----	------------	-----	------------	-----



Orbitz	424	Pavilion	417	Rave	421	Renovations	366	Replay	197	Revive	150
--------	-----	----------	-----	------	-----	-------------	-----	--------	-----	--------	-----



Riverside	116	Rizu	416	Roxbury	38	Santiago	94	Satin-Etched Glass	464
-----------	-----	------	-----	---------	----	----------	----	--------------------	-----



Savannah	213	Spirit	439	Status	21	Stroll	84	The Pointe	8	Torino	364
----------	-----	--------	-----	--------	----	--------	----	------------	---	--------	-----



Trinity	356	Victorian	391	Victorian Glass	464	Wisten	174
---------	-----	-----------	-----	-----------------	-----	--------	-----



# OUTDOOR FAMILY INDEX

Andover 549 Andover CFL607 Anson CFL 606 Arrive LED 526 Arts & Crafts 506 Ashmore 543



Ashmore CFL598 Bay Court 571 Brass Guard 587 Brookside 553 Brookside LED 530 Cadence 534



Compel 573 Coventry 551 Crawford 537 Crawford CFL 596 Derby 554 Derby LED 531



Dibs 568 Edition 580 Enchant 548 Endorse 528 Essential 581 Fairview 577



Fairview CFL599 Format 572 Greetings 566 Jack 606 Jack CFL 596 Loyal 594





Mac 557 Mansard 611 Meadowlark 545 Meridian 540 Merit 556 Mission 561



Newport 611 Nottingham 541 Onion 578 Parker CFL 497 Pedigree CFL 591 Peek-a-Boo 504



Penfield 562 Prairie 559 Prestwick 546 Promenade 592 Regatta 564 Residence 555



Resort 538 Roman Coach 584 Roman Coach CFL 608 Salute 544 Scope 565 Valera CFL 496



Via 593 Welbourne 574 Welbourne CFL 600 Westport 582 Westport CFL 602 Westport LED 532



# PRODUCT INDEX

## MLS

MLS13GUWW	685
MLS18GUWW	685
MLS26GUWW	685

## P1000

P45	655
P62	676
P63	670, 675
P66	670, 675
P68	670, 675
P83	660, 662
P84	657
P85	656, 678
P86	653
P87	648, 650
P88	662

P162H	671
P163H	671
P166H	671
P168H	671
P182H	673
P183	660
P183H	673
P184	657
P185	656
P186	653
P186H	673
P187	650
P188H	673
P245	655
P645	654
P745	654
P816	659
P817	659, 679
P818	659
P821	652, 674, 677
P830	649, 658, 663
P831	649, 658, 679
P832	649, 658

## P2000

P2000	436
P2001	436
P2002	436
P2003	436
P2004	444
P2005	444
P2006	444
P2007	444
P2008	450
P2009	450
P2010	451
P2011	451
P2012	378
P2013	378
P2014	378
P2015	378
P2016	444
P2018	447
P2019	447
P2020	447
P2021	447
P2026	317, 489
P2033	418, 488

P2034	418
P2035	418
P2036	418
P2037	419
P2038	419
P2039	419
P2040	419
P2041	158, 409
P2046	65, 382
P2047	382
P2048	382
P2049	382
P2050	16
P2055	91
P2060	21
P2061	410, 485
P2062	410
P2063	410
P2064	410
P2070	421
P2071	421
P2072	421
P2073	421
P2074	150, 388
P2075	388
P2076	388
P2077	388
P2078	408
P2079	408
P2080	409
P2081	409
P2087	133, 398
P2088	398
P2089	399
P2090	399
P2091	412, 485
P2092	412, 485
P2093	412
P2094	412
P2095	107, 397
P2096	397
P2097	397
P2098	376
P2099	12, 376

P2100	376
P2101	384
P2102	384
P2107	425
P2108	425
P2109	425
P2110	425
P2111	435
P2112	435
P2113	435
P2114	435
P2115	385
P2116	385
P2117	385
P2118	385
P2119	415
P2120	415
P2121	415
P2122	415
P2123	414, 488
P2124	414

P2125	414
P2126	414
P2131	197
P2132	84, 396
P2133	396
P2134	396
P2135	439
P2136	439
P2137	439
P2138	439
P2139	87, 396
P2141	396

P2300	329
P2301	329
P2302	328
P2303	328
P2304	329
P2305	329
P2306	342, 484
P2307	342, 484
P2308	342, 484
P2309	342, 484
P2310	342, 484
P2311	342, 484
P2312	85, 309
P2315	133, 313
P2321	328
P2322	328

P2500	361
P2501	360
P2502	363
P2503	357
P2514	356
P2521	358
P2522	360
P2524	361
P2525	362
P2526	363
P2530	355
P2531	354
P2533	362

P2600	369
P2601	372
P2602	370
P2603	373
P2604	373
P2605	373
P2606	373
P2607	373
P2608	373
P2609	373
P2610	369
P2611	372
P2612	367
P2613	373
P2614	373
P2616	369
P2618	373
P2620	371
P2621	371
P2623	366
P2625	366
P2628	367

P2630	373
P2631	373
P2636	372
P2642	368
P2643	368
P2644	370
P2645	364
P2649	365
P2650	365
P2651	364
P2654	365
P2655	359
P2656	366
P2658	371

P2706	452
P2707	453
P2708	452
P2709	453
P2713	452
P2714	452
P2724	38, 379
P2726	36, 379
P2727	379
P2728	379
P2729	42
P2730	389
P2731	389
P2732	389
P2733	432
P2738	432
P2743	432
P2745	432
P2752	94, 394
P2753	99, 394
P2754	394
P2758	426
P2759	427
P2760	427
P2772	34
P2783	123, 406
P2784	406
P2785	407
P2786	407
P2794	174, 423
P2795	423
P2796	423
P2797	423

P2801	417
P2802	417
P2803	417
P2804	417
P2805	416
P2806	416
P2807	416
P2808	416
P2810	392
P2811	392
P2812	392
P2813	392
P2816	34
P2817	39, 303
P2819	303
P2823	393, 488
P2824	393

P2825	393
P2826	393
P2841	103, 311
P2842	393, 488
P2843	68
P2844	393
P2845	393
P2846	428
P2847	429
P2848	429
P2849	77
P2851	320
P2852	393
P2879	92
P2881	127, 403
P2882	403
P2883	403
P2884	403
P2885	381
P2886	381
P2887	381
P2888	381

P2900	115
P2901	81, 413
P2905	413
P2913	448
P2915	448
P2918	111, 395
P2919	448
P2920	380
P2927	380
P2928	448
P2933	29
P2951	92
P2959	179, 422
P2967	402
P2968	402
P2969	402
P2977	422
P2978	422
P2989	386
P2991	386
P2992	387
P2997	387
P2998	422

## P3000

P3002	401, 492
P3003	401
P3004	401
P3005	401
P3012	103, 402
P3016	144, 389
P3022	395
P3023	395
P3024	395
P3025	458
P3026	458
P3027	391
P3028	391
P3029	391
P3030	424
P3038	458
P3040	458
P3041	391

P3051	454	P3266	218, 449	P3468	218	P3567	341	P3753	253
P3052	454	P3267	449	P3473	229, 326	P3568	341	P3754	253
P3053	454	P3268	449	P3474	225, 326	P3569	341	P3756	339, 467
P3054	454	P3269	449	P3475	326	P3570	341	P3757	175
P3055	454	P3270	433	P3476	326	P3572	16, 302	P3759	307
P3056	454	P3287	457	P3477	326	P3573	254	P3760	331
P3057	424	P3288	457	P3478	321	P3574	16	P3761	331
P3058	424	P3289	457	P3479	321	P3575	255	P3762	331
P3076	377	P3290	319	P3480	340	P3576	16	P3764	331
P3077	377	P3294	433	P3481	340	P3577	101	P3765	331
P3078	377	P3298	459	P3482	340	P3587	187	P3772	315
P3092	116, 400	P3299	459	P3483	341	P3597	201, 322	P3773	218
P3093	400			P3484	341	P3598	311	P3779	252
P3094	400	P3300	459	P3485	341	P3599	349	P3780	322
P3095	400	P3301	456	P3486	254			P3781	202
		P3302	456	P3487	255	P3602	333	P3785	219
P3101	383	P3303	456	P3489	340	P3605	349	P3788	244, 326
P3102	383	P3311	325	P3490	334	P3606	111	P3791	57
P3103	383	P3312	325	P3491	340	P3607	145, 315	P3792	220
P3104	383	P3325	205	P3492	341	P3608	148	P3793	221
P3105	383	P3326	315	P3495	303	P3613	115	P3794	220
P3110	464, 498	P3333	459			P3614	321	P3799	234
P3111	464, 498	P3335	459	P3500	323	P3615	90, 308		
P3114	459	P3360	501	P3501	323	P3623	349, 615	P3801	248
P3115	459	P3361	501	P3502	323	P3624	332	P3802	248
P3116	459	P3362	501	P3505	135	P3625	88	P3803	333
P3117	459	P3363	501	P3506	323	P3626	90	P3804	333
P3118	459	P3367	244, 456	P3507	107, 309	P3627	304	P3806	224
P3131	434	P3368	456	P3509	173, 309	P3629	66	P3807	224
P3132	434	P3369	456	P3510	173	P3637	346	P3813	464
P3133	434	P3373	457	P3511	334	P3641	312	P3814	141
P3134	434	P3374	457	P3513	310	P3642	332	P3815	308
P3135	430	P3375	457	P3515	315	P3645	252, 350	P3816	330
P3136	431	P3376	457	P3516	348	P3651	332	P3817	330
P3137	431			P3518	348	P3660	332	P3818	330
P3153	449	P3400	45, 303	P3519	119	P3661	21	P3820	49
P3154	449	P3401	349	P3520	348	P3663	325	P3821	193
P3155	449	P3403	84	P3524	348	P3675	344	P3824	128
P3156	449	P3405	348	P3525	311	P3678	125, 313	P3827	59
P3161	440, 220	P3406	348	P3526	348	P3680	18	P3829	313
P3162	440	P3408	352	P3527	333	P3682	25	P3830	464
P3163	440	P3410	352	P3528	348	P3684	104	P3832	464
P3164	440	P3411	338, 486	P3529	50, 306	P3686	104	P3836	318
P3184	314	P3412	352	P3530	50, 306	P3687	332	P3837	310
P3187	456	P3414	323	P3531	50, 306	P3688	331	P3839	98
P3188	456	P3417	338, 486	P3532	124	P3689	331	P3840	98
P3190	226, 442	P3423	320	P3536	350	P3690	252, 350	P3843	128, 314
P3191	442	P3424	320	P3538	350	P3693	316	P3846	181
P3192	443	P3425	333	P3539	324	P3694	316, 467	P3847	131
P3193	443	P3426	333	P3540	324	P3695	339, 467	P3852	322
		P3427	333	P3541	324	P3697	331	P3853	312
P3203	349	P3431	333	P3542	215			P3854	322
P3204	213, 437	P3432	338, 486	P3547	350	P3701	63	P3855	323
P3205	437	P3433	346	P3548	350	P3705	349	P3870	318
P3206	437	P3434	302	P3549	334	P3707	304	P3876	330
P3207	437	P3440	141, 312	P3550	319	P3715	614	P3878	168, 319
P3209	166, 420	P3446	138	P3551	334	P3716	252	P3881	33, 262, 302
P3210	420	P3447	338, 486	P3552	66	P3717	312	P3883	530, 583, 602
P3213	349, 612	P3448	338, 486	P3557	52, 306	P3718	110, 312	P3884	60
P3216	140, 404	P3449	338, 486	P3558	52, 306	P3730	351	P3885	312
P3222	404	P3450	197	P3559	52, 306	P3731	351	P3886	307
P3223	420	P3452	54	P3560	106	P3737	466	P3888	60
P3236	420	P3455	208	P3561	340	P3738	321	P3889	59
P3248	404	P3458	251	P3562	340	P3740	316	P3892	498
P3249	404	P3460	335	P3563	340	P3741	317	P3893	498
P3265	204, 433	P3464	120	P3564	340	P3747	339, 466	P3898	78
		P3467	218, 327	P3565	308	P3750	349		

# PRODUCT INDEX

P3902 .....61	P4069 ..... 219	P4314 ..... 122	P4508 .....38	P4689 ..... 154
P3903 .....61	P4070 ..... 216	P4315 ..... 138	P4509 ..... 147	P4690 ..... 157
P3904 .....61	P4082 ..... 203	P4316 ..... 138	P4510 ..... 149	P4695 ..... 160
P3906 ..... 201	P4083 ..... 203	P4317 ..... 139	P4523 .....14	P4696 ..... 160
P3909 ..... 74, 268	P4085 ..... 202	P4318 ..... 197	P4524 .....14	P4697 ..... 158
P3910 ..... 344	P4086 ..... 203	P4319 ..... 195	P4525 .....16	
P3911 ..... 344	P4088 ..... 48	P4324 ..... 226	P4526 .....16	P4705 .....67
P3912 ..... 189	P4089 ..... 48	P4325 ..... 227	P4527 .....88	P4706 .....65
P3914 ..... 238	P4090 ..... 48	P4326 ..... 225	P4528 .....88	P4707 .....64
P3921 .....78	P4094 ..... 250	P4327 ..... 227	P4529 .....89	P4708 .....67
P3924 ..... 337	P4095 ..... 250	P4328 ..... 226	P4537 ..... 169	P4709 ..... 100
P3925 ..... 337		P4329 ..... 229	P4538 .....31	P4710 ..... 101
P3926 ..... 327, 336	P4100 ..... 115	P4346 ..... 247	P4539 ..... 166	P4711 ..... 100
P3927 ..... 335	P4102 ..... 115	P4349 .....70	P4552 .....91	P4713 .....27
P3928 ..... 236	P4113 ..... 146	P4354 ..... 247	P4558 ..... 211	P4714 .....27
P3929 ..... 239	P4114 ..... 148	P4355 ..... 246	P4559 ..... 210	P4742 .....54
P3931 ..... 234	P4115 ..... 145	P4356 ..... 246	P4579 ..... 205	P4744 .....54
P3932 .....71	P4116 ..... 146	P4357 ..... 248	P4580 ..... 205	
P3939 ..... 325	P4120 ..... 212	P4358 ..... 248	P4586 .....96	P4803 ..... 112
P3940 .....58	P4121 ..... 214	P4359 ..... 248	P4587 .....95	P4805 ..... 112
P3941 ..... 305, 571	P4122 ..... 215	P4365 ..... 228	P4588 .....96	
P3942 ..... 305, 571	P4138 .....20	P4390 ..... 244	P4592 ..... 207	P4961 ..... 353
P3944 ..... 177	P4139 .....31	P4391 ..... 245		P4962 ..... 353
P3946 .....24	P4140 .....18		P4603 ..... 207	P4971 ..... 353
P3947 .....24	P4141 .....18	P4400 .....77	P4604 ..... 206	
P3951 ..... 186	P4142 .....19	P4401 ..... 292	P4605 ..... 208	P5000
P3954 ..... 164, 317	P4147 ..... 105	P4402 ..... 292	P4609 ..... 353	P5000 ..... 111, 272
P3955 ..... 241	P4158 ..... 125	P4403 ..... 292	P4610 ..... 353	P5001 ..... 111, 272
P3956 ..... 339	P4179 .....99	P4405 ..... 128	P4611 ..... 209	P5002 ..... 116, 272
P3969 ..... 190	P4185 .....81	P4406 ..... 292	P4619 ..... 181	P5003 ..... 284
P3970 ..... 304	P4188 .....49	P4409 .....93	P4621 ..... 191	P5007 ..... 46, 264
P3971 ..... 151		P4410 .....93	P4622 ..... 189	P5010 ..... 107, 266
P3977 ..... 178	P4200 ..... 103	P4411 .....92	P4623 ..... 193	P5011 ..... 284
P3986 ..... 313	P4201 ..... 102	P4415 ..... 129	P4624 ..... 157	P5012 ..... 284
P3997 ..... 332	P4202 ..... 103	P4416 ..... 127	P4625 ..... 190	P5013 ..... 297
P3998 ..... 332	P4203 ..... 104	P4417 ..... 129	P4626 ..... 180	P5014 ..... 260
P3999 ..... 332	P4208 .....41	P4418 ..... 131	P4627 ..... 238	P5016 ..... 64, 267
	P4209 .....43	P4419 ..... 130	P4629 .....31	P5017 ..... 14, 261
P4000	P4210 .....45	P4421 .....76	P4630 .....33	P5019 ..... 28, 262
P4001 ..... 200	P4212 ..... 117	P4422 .....75	P4632 ..... 232	P5020 ..... 114, 272
P4002 ..... 199	P4213 ..... 118	P4431 .....31	P4635 ..... 233	P5023 ..... 281
P4003 ..... 200	P4214 ..... 117	P4434 ..... 175	P4638 ..... 231	P5024 ..... 281
P4004 ..... 199	P4217 ..... 250	P4435 ..... 174	P4641 ..... 177	P5026 ..... 154, 278
P4005 ..... 138	P4227 ..... 150	P4436 ..... 170	P4642 ..... 177	P5031 ..... 20, 262
P4006 ..... 140	P4228 ..... 152	P4439 ..... 170	P4643 ..... 177	P5032 ..... 134, 274
P4007 ..... 214	P4229 ..... 118	P4440 ..... 237	P4644 .....23	P5033 ..... 85, 266
P4008 ..... 251	P4234 ..... 150	P4441 ..... 237	P4645 .....23	P5034 ..... 46, 264
P4009 ..... 251	P4235 ..... 151	P4458 ..... 179	P4646 .....25	P5036 ..... 267
P4010 ..... 212	P4236 ..... 153	P4459 ..... 179	P4650 ..... 234	P5037 ..... 267
P4014 ..... 185, 192	P4238 ..... 121	P4462 .....69	P4651 .....12	P5038 ..... 82, 269
P4032 .....87	P4245 ..... 119	P4463 .....72	P4652 .....13	P5039 ..... 90, 271
P4035 ..... 106	P4249 .....84	P4464 .....73	P4659 ..... 162	P5040 ..... 214, 289
P4036 ..... 106	P4250 .....85	P4489 ..... 187	P4660 ..... 164	P5041 ..... 265
P4037 ..... 107	P4266 ..... 110	P4490 ..... 183	P4661 ..... 162	P5042 ..... 292
P4038 .....87	P4268 ..... 108	P4491 .....52	P4662 ..... 164	P5043 ..... 8, 261
P4039 ..... 142	P4270 ..... 133	P4492 ..... 184	P4663 ..... 165	P5044 .....24, 263, 302
P4040 ..... 143	P4271 ..... 132	P4497 ..... 185	P4664 ..... 240	P5046 ..... 161
P4053 ..... 198	P4272 ..... 134		P4666 ..... 241	P5047 ..... 161
P4055 ..... 110	P4275 ..... 217	P4500 .....35	P4668 ..... 242	P5050 ..... 280
P4057 ..... 217	P4276 ..... 216	P4501 .....36	P4673 .....47	P5051 ..... 11, 261
P4059 ..... 110	P4280 ..... 222	P4502 .....36	P4674 .....47	P5053 ..... 284
P4060 ..... 108	P4281 ..... 222	P4503 .....37	P4675 .....46	P5054 ..... 71, 266
P4061 ..... 108	P4282 ..... 223	P4504 .....37	P4685 .....22	P5055 ..... 139, 275
P4062 .....33	P4283 ..... 221	P4505 .....39	P4686 ..... 243	P5056 ..... 70, 266
P4067 ..... 216	P4288 ..... 123	P4506 .....37	P4687 ..... 190	P5065 ..... 232, 290
P4068 ..... 217		P4507 .....39	P4688 ..... 155	P5067 ..... 279

P5068	216, 289	P5187	285	P5401	579	P5589	62, 570	P5728	566
P5070	279	P5188	280	P5402	577	P5590	568	P5729	616
P5076	97, 270	P5192	8	P5414	611			P5730	586
P5078	221, 286	P5193	187, 288	P5420	540	P5602	616	P5731	586
P5079	223, 286	P5195	294	P5426	613	P5603	616	P5736	492, 606
P5080	297	P5196	294	P5428	560	P5604	616	P5737	610
P5083	105, 271	P5197	280	P5429	551	P5607	589	P5738	610
P5084	204, 290	P5198	257	P5430	587	P5612	612	P5741	620, 623
P5087	296	P5199	257	P5432	586	P5616	617	P5744	616
P5090	245, 295			P5434	582, 603	P5626	613	P5745	616
P5091	297	P5200	636	P5436	613	P5628	560	P5749	531, 554
P5094	296	P5202	627	P5438	541	P5629	560	P5750	531, 554
P5095	228, 291	P5203	627	P5444	611	P5631	566	P5751	531, 554
P5096	229, 291	P5204	636	P5445	531, 582	P5636	613	P5756	587
P5097	282	P5205	637	P5446	613	P5641	620, 623	P5758	587
		P5207	627	P5449	566	P5642	620, 623	P5759	561
P5100	39, 264	P5210	636	P5450	543	P5643	624	P5762	585
P5103	297	P5212	627	P5453	544	P5644	624	P5763	559
P5104	147, 274	P5214	627	P5456	610	P5645	611	P5764	559
P5105	33, 262	P5219	636	P5459	557	P5649	543	P5765	585
P5108	172, 277	P5223	640	P5461	561	P5650	543	P5766	608
P5110	161, 276	P5224	640	P5463	559	P5651	543	P5767	585
P5112	172, 277	P5225	633, 636	P5468	545	P5652	542	P5768	561
P5113	239, 293	P5228	638	P5472	563	P5653	542	P5770	608
P5114	165, 275	P5229	638	P5474	536	P5656	610	P5772	608
P5118	168, 276	P5230	639	P5475	584	P5657	610	P5773	584
P5122	105, 271	P5233	637	P5478	613	P5662	588	P5774	621, 623
P5123	10	P5234	639	P5479	554	P5670	537	P5775	577
P5124	279	P5235	639	P5482	574, 601	P5671	537	P5777	584
P5125	206, 290	P5237	639	P5483	575	P5672	537	P5778	577
P5128	176, 293	P5238	636	P5484	546	P5673	537	P5780	577
P5131	240	P5239	639	P5485	576	P5674	621, 623	P5788	351, 617
P5135	201, 286	P5241	639	P5486	576	P5675	621, 623	P5789	351, 617
P5137	282	P5245	632	P5487	549	P5681	574	P5790	607, 495
P5138	282	P5246	632	P5489	599	P5682	574, 601	P5791	618
P5139	138, 274	P5247	632	P5490	568	P5683	575, 600		
P5140	93, 270	P5248	636	P5492	599	P5684	576, 600	P5800	496, 605
P5141	124, 273	P5250	543, 634	P5493	611	P5685	597	P5801	496, 605
P5142	57, 265	P5253	634	P5494	599	P5686	596	P5806	496, 605
P5144	126, 273, 314	P5256	75, 268	P5496	599	P5687	549	P5813	612
P5145	216, 289	P5257	634	P5499	571	P5688	549	P5814	611
P5147	179, 287	P5258	527			P5689	549	P5815	611
P5148	153, 275	P5261	561, 634	P5501	579	P5690	576	P5816	614
P5151	113	P5262	561, 640	P5502	545	P5691	618	P5817	612
P5153	126, 273	P5265	636	P5503	562	P5694	619	P5818	612
P5154	10	P5270	186, 288	P5510	617	P5695	618	P5820	540
P5155	82, 269	P5271	634	P5511	617			P5821	613
P5156	82, 269	P5272	550, 634	P5512	617	P5700	578	P5822	540
P5157	11	P5273	634	P5520	540	P5701	578	P5823	540
P5158	287	P5275	551, 635	P5528	560	P5702	615	P5824	540
P5160	210, 289	P5276	635	P5529	551	P5703	615	P5826	588
P5161	279	P5279	639	P5530	531, 582	P5704	615	P5828	550
P5162	195	P5295	638	P5538	541	P5705	615	P5829	551
P5163	283	P5296	633	P5547	599	P5706	615	P5831	587
P5165	87	P5297	633, 636	P5549	566	P5710	618	P5832	587
P5167	172, 277	P5298	632, 635	P5550	542	P5711	618	P5834	252, 351, 587
P5170	195	P5299	633, 639	P5554	544	P5712	625	P5835	541
P5171	49, 263			P5559	557	P5713	625	P5836	541
P5173	155, 278	P5300	192, 288	P5562	543	P5715	545	P5837	541
P5177	285	P5306	23, 263	P5563	559	P5716	545	P5838	541
P5181	281	P5312	637	P5565	584	P5717	545	P5843	614
P5182	283	P5313	637	P5574	536	P5719	566	P5844	612
P5183	283	P5314	260	P5579	554	P5721	553	P5846	587
P5184	287	P5390	628	P5582	575, 601	P5722	552	P5848	577
P5185	8	P5391	628	P5584	547	P5723	530, 553	P5849	570
P5186	285	P5392	628	P5587	549	P5727	616	P5851	571
		P5394	628						



# PRODUCT INDEX

P5854 .....	542	P6040 .....	595	P6228 .....	512	P6817 .....	641, 682	P7095 .....	463
P5862 .....	530, 583, 602	P6041 .....	595	P6280 .....	517	P6818 .....	682	P7096 .....	463
P5863 .....	531, 583, 602	P6042 .....	595			P6819 .....	641, 682		
P5864 .....	530, 583, 602	P6045 .....	569, 492	P6325 .....	517	P6820 .....	682	P7103 .....	494
P5874 .....	598	P6046 .....	569	P6326 .....	517	P6821 .....	682	P7112 .....	497
P5875 .....	598	P6047 .....	565	P6327 .....	517	P6824 .....	682	P7113 .....	497
P5876 .....	598	P6048 .....	565	P6328 .....	518	P6825 .....	682	P7114 .....	462
P5878 .....	578	P6049 .....	565	P6329 .....	518	P6826 .....	682	P7115 .....	462
P5881 .....	614	P6052 .....	555	P6339 .....	519	P6827 .....	641, 683	P7116 .....	462
P5887 .....	607	P6053 .....	555	P6369 .....	519	P6828 .....	641, 683	P7118 .....	347, 615
P5888 .....	607	P6054 .....	555	P6397 .....	505	P6829 .....	641, 683	P7121 .....	499
P5891 .....	629	P6055 .....	555	P6398 .....	500	P6832 .....	641, 683	P7122 .....	144, 490
P5895 .....	562	P6056 .....	528					P7124 .....	619
P5896 .....	563	P6057 .....	528	P6400 .....	556	P6917 .....	681	P7128 .....	463
P5897 .....	562	P6058 .....	528	P6401 .....	548	P6952 .....	681	P7129 .....	463
P5899 .....	563	P6059 .....	581	P6403 .....	590			P7130 .....	463
		P6060 .....	581	P6404 .....	539	P7000		P7131 .....	463
P5906 .....	557	P6062 .....	572	P6405 .....	564	P7001 .....	481	P7132 .....	463
P5907 .....	557	P6063 .....	572	P6408 .....	613	P7002 .....	475	P7133 .....	463
P5914 .....	497, 604	P6064 .....	572	P6409 .....	593	P7004 .....	480	P7134 .....	8, 376
P5915 .....	497, 604	P6067 .....	526	P6414 .....	681	P7005 .....	475	P7137 .....	471
P5920 .....	546	P6068 .....	526	P6416 .....	681	P7007 .....	481	P7138 .....	401, 492
P5921 .....	546	P6069 .....	526	P6417 .....	585	P7008 .....	481	P7142 .....	113, 376
P5923 .....	547	P6070 .....	580	P6418 .....	592	P7009 .....	481	P7151 .....	499
P5948 .....	606, 492	P6071 .....	580	P6419 .....	596	P7011 .....	480	P7153 .....	495
P5949 .....	606	P6072 .....	580	P6420 .....	573	P7012 .....	475	P7154 .....	471
P5953 .....	544	P6076 .....	527	P6421 .....	594	P7013 .....	475	P7155 .....	27
P5954 .....	544	P6080 .....	535	P6427 .....	527	P7014 .....	480	P7156 .....	490
P5955 .....	544	P6081 .....	535	P6428 .....	572	P7015 .....	480	P7158 .....	101
P5959 .....	548	P6082 .....	535	P6429 .....	580	P7016 .....	480	P7170 .....	494
P5966 .....	548	P6083 .....	534	P6434 .....	565	P7017 .....	481	P7171 .....	494
P5967 .....	548			P6435 .....	534	P7018 .....	481	P7175 .....	494
P5968 .....	626	P6104 .....	519	P6452 .....	555	P7019 .....	481	P7176 .....	494
P5969 .....	626	P6105 .....	519			P7020 .....	476	P7181 .....	127, 491
P5970 .....	626	P6111 .....	514	P6500 .....	556	P7021 .....	476	P7182 .....	347, 615
P5980 .....	591	P6112 .....	514	P6501 .....	548	P7022 .....	476	P7183 .....	470
P5981 .....	591	P6115 .....	514	P6503 .....	590	P7023 .....	476	P7184 .....	211, 491
P5982 .....	591	P6116 .....	514	P6504 .....	538	P7025 .....	460	P7185 .....	491
P5985 .....	609	P6117 .....	514	P6505 .....	295, 564	P7026 .....	235, 490	P7186 .....	470
P5986 .....	609	P6119 .....	511	P6509 .....	593	P7032 .....	477	P7189 .....	471
P5987 .....	539	P6124 .....	511	P6514 .....	294, 572	P7033 .....	477	P7195 .....	499
P5988 .....	539	P6125 .....	511	P6518 .....	592	P7034 .....	477	P7196 .....	470
P5989 .....	539	P6126 .....	511	P6519 .....	597	P7035 .....	477		
P5990 .....	568	P6132 .....	670	P6520 .....	573	P7040 .....	472	P7200 .....	499
P5991 .....	568	P6135 .....	510	P6521 .....	594	P7041 .....	472	P7201 .....	471
P5992 .....	568	P6136 .....	510	P6526 .....	529	P7042 .....	472	P7206 .....	469
P5996 .....	548	P6137 .....	510	P6527 .....	527	P7044 .....	494	P7210 .....	212, 491
P5997 .....	564	P6138 .....	508	P6528 .....	294, 572	P7045 .....	494	P7211 .....	460
P5998 .....	564	P6139 .....	509	P6529 .....	580	P7046 .....	22, 377, 488	P7212 .....	460
P5999 .....	557	P6140 .....	508	P6534 .....	565	P7049 .....	47, 380	P7213 .....	470
		P6144 .....	505	P6535 .....	534	P7052 .....	493	P7214 .....	470
P6000		P6145 .....	503	P6552 .....	555	P7056 .....	489	P7215 .....	470
P6000 .....	556	P6146 .....	503			P7068 .....	493	P7216 .....	470
P6001 .....	556	P6147 .....	505	P6602 .....	569, 495	P7077 .....	58, 265	P7218 .....	461, 469
P6002 .....	556	P6149 .....	505	P6603 .....	569, 495	P7078 .....	58	P7221 .....	461, 469
P6010 .....	593	P6153 .....	503	P6606 .....	539	P7079 .....	490	P7227 .....	460
P6011 .....	593	P6154 .....	602	P6607 .....	590	P7081 .....	493	P7228 .....	460
P6012 .....	593	P6155 .....	500	P6613 .....	597	P7082 .....	493	P7229 .....	460
P6017 .....	531, 554	P6160 .....	504	P6614 .....	596	P7083 .....	487, 498	P7230 .....	462
P6019 .....	584	P6161 .....	504	P6676 .....	653	P7085 .....	487, 498	P7231 .....	462
P6023 .....	557	P6162 .....	504	P6678 .....	653	P7086 .....	58	P7232 .....	462
P6033 .....	592	P6163 .....	502			P7087 .....	497	P7236 .....	461
P6034 .....	592	P6178 .....	508	P6802 .....	641, 682	P7088 .....	487	P7237 .....	461
P6035 .....	592	P6182 .....	508	P6803 .....	641, 682	P7092 .....	487, 495	P7249 .....	344, 468, 498
P6038 .....	573			P6805 .....	682	P7093 .....	487, 494	P7250 .....	468
P6039 .....	573	P6227 .....	512	P6816 .....	682	P7094 .....	463	P7251 .....	468

P7252	468	P7833	685	P8071	648, 674	P8516	522	P8707	513
P7258	468	P7834	685	P8072	651,652, 663	P8517	642	P8708	643
P7262	470				665, 672, 676,677	P8518	642	P8709	298
P7263	470	P8000	655	P8073	653	P8519	642	P8710	624
P7264	470	P8001	655	P8074	651, 652, 676 677	P8520	642	P8711	473
P7265	471	P8002	667	P8075	651,652, 663	P8521	642	P8712	625
P7266	471	P8004	655		665, 676, 677	P8522	642	P8715	523
P7267	471	P8005	666	P8076	651,652 677	P8523	642	P8716	680
P7268	471	P8006	666	P8077	651,652, 677	P8524	643	P8717	522
P7273	470	P8007	651,652,677	P8078	651,652 677	P8525	643	P8718	523
P7274	470	P8008	650,653,665,676	P8079	651,652, 677	P8526	643	P8719	298
P7275	470	P8009	651,652, 677	P8080	649	P8531	643	P8720	521
P7276	470	P8010	653	P8082	651,652, 677	P8555	680	P8721	521
P7278	469	P8011	651,652, 677	P8096	663	P8562	643	P8722	521
P7279	469					P8584	680	P8723	521
P7280	468	P8014	670, 671	P8100	681	P8585	680	P8724	522
P7285	468	P8015	670, 671	P8102	669	P8587	680	P8725	681
		P8016	670, 671	P8103	664	P8588	680	P8726	628
P7307	346	P8020	653	P8104	665	P8589	680	P8727	522
P7309	346	P8021	666, 667	P8105	665	P8590	642	P8728	523
P7310	346	P8022	343, 646	P8106	665	P8591	642	P8730	522
P7312	353	P8023	666	P8109	656,657, 678	P8592	642	P8731	471
P7315	340	P8025	651,652,653,	P8112	666, 667	P8593	680	P8732	473
P7316	340		665, 676, 677	P8113	672, 673	P8595	647	P8733	474, 476
P7319	341	P8027	651	P8114	672, 673	P8601	300	P8734	523
P7320	341	P8028	653	P8115	672, 673	P8603	481	P8735	474, 476
P7322	254	P8030	670,671, 675	P8116	672, 673	P8604	479	P8736	521
P7323	255	P8031	670,671, 675	P8120	668, 669	P8607	680	P8737	474, 476
P7324	340	P8032	670,671, 675	P8121	668, 669	P8608	481	P8738	474, 476
P7325	340	P8033	675	P8123	666	P8613	638, 643	P8739	681
P7326	340	P8034	670,671, 675	P8130	672, 673	P8614	643	P8740	475, 477
P7327	341	P8035	670,671, 675	P8131	672, 673	P8617	643	P8741	624
P7328	341	P8036	659, 679	P8133	668, 669	P8618	643	P8742	522
P7329	341	P8037	659, 679	P8135	672, 673	P8625	301	P8743	475, 477
P7337	615	P8038	675	P8144	663	P8626	643	P8744	473
P7338	615	P8039	659, 679	P8145	663	P8628	643	P8745	522
P7339	615	P8041	658, 679	P8152	664	P8632	298	P8746	522
P7340	614	P8042	658, 679	P8153	664	P8639	298	P8747	473
P7372	345, 619	P8043	658, 679	P8168	656, 678	P8640	298	P8748	628
P7373	345, 619	P8044	658, 679	P8170	672	P8643	681	P8749	473
P7375	345, 619	P8045	659, 679	P8172	656, 678	P8651	643	P8750	473
P7376	345, 619	P8046	658, 679	P8175	656, 678	P8652	479, 513	P8751	522
P7377	345	P8047	658, 679	P8176	656,657, 678	P8653	479, 513	P8752	473
P7378	345	P8048	658, 679			P8654	479, 513	P8753	522
P7379	347	P8049	658, 679	P8206	664	P8655	479, 513	P8754	473
P7380	347	P8050	666, 667	P8212	666	P8666	643	P8755	299
P7381	347	P8051	666, 667	P8213	672	P8667	643	P8757	299
P7382	347	P8052	650,652, 663	P8214	667	P8670	300	P8759	299
P7383	346		665, 676, 677	P8215	669	P8671	643	P8760	522
P7384	346	P8053	651,652, 663	P8216	665	P8672	643	P8766	257
P7385	346		665, 676,677	P8218	671, 672	P8678	301	P8768	256
		P8056	659, 679	P8220	668	P8683	472	P8769	298
P7510	474	P8057	659, 679	P8222	647	P8684	638	P8770	522
P7520	479	P8060	650,652, 653	P8223	666	P8685	300, 685	P8771	522
P7533	478		665, 676,677	P8226	672	P8698	469	P8772	298
		P8061	649	P8232	672	P8699	643	P8773	680
P7801	685	P8062	650,652, 653	P8240	343			P8774	529
P7802	479, 685		665, 676,677	P8241	343			P8775	529
P7805	685	P8063	653	P8247	343			P8776	512
P7807	685	P8064	664	P8270	642	P8700	680	P8777	512, 523
P7812	685	P8065	650, 677			P8701	298	P8778	512
P7818	685	P8066	651,652, 653	P8367	656,657, 678	P8702	298	P8779	529
P7829	685		665, 676, 677	P8368	657	P8703	298	P8780	512
P7830	685	P8067	664	P8375	657	P8704	298	P8781	512
P7831	685	P8068	651,652, 653			P8705	473	P8782	512
P7832	685		665, 676	P8511	680	P8706	513	P8783	512

# PRODUCT INDEX

P8784 .....	512	P8822 .....	257	P9051 .....	507	P9111 .....	522	P9217 .....	520
P8785 .....	512	P8823 .....	257	P9052 .....	507	P9113 .....	523	P9218 .....	519
P8786 .....	513	P8824 .....	256	P9054 .....	507	P9115 .....	521	P9219 .....	518
P8788 .....	298	P8825 .....	256	P9061 .....	506	P9116 .....	521	P9220 .....	518
P8789 .....	538			P9062 .....	506	P9117 .....	521		
P8790 .....	513	P8926 .....	298	P9071 .....	506	P9121 .....	522	PC - PV	
P8791 .....	513	P8928 .....	256	P9072 .....	506	P9122 .....	522	PC001 .....	626
P8792 .....	513	P8929 .....	257	P9081 .....	506	P9123 .....	522	PE008 .....	684
P8793 .....	513	P8930 .....	27, 298	P9082 .....	506			PE009 .....	684
P8794 .....	512	P8931 .....	27, 298			P9200 .....	516	PE010 .....	684
P8795 .....	512	P8932 .....	411	P9103 .....	521	P9201 .....	516	PE011 .....	684
P8797 .....	624	P8934 .....	411	P9104 .....	521	P9203 .....	517	PE012 .....	684
P8798 .....	624			P9105 .....	521	P9204 .....	517	PHFC .....	629
P8799 .....	624	P9000		P9106 .....	521	P9205 .....	515	PHGH .....	629
		P9001 .....	507	P9107 .....	522	P9206 .....	515	PHSL .....	629
P8820 .....	256	P9010 .....	507	P9108 .....	522	P9207 .....	515	PV008 .....	465
P8821 .....	256	P9021 .....	507	P9109 .....	522	P9215 .....	520	PV020 .....	465
		P9031 .....	507	P9110 .....	522	P9216 .....	520	PV021 .....	465



## Important notice regarding lamping information in this catalog:

In 2007, Congress passed the Energy Independence and Security Act – this legislation has commonly been referred to as the “Ban the Bulb” law. [Canada’s Parliament enacted similar efficiency laws in this same time period.] While the act requires manufacturers to offer more efficient incandescent lamps, it does not “ban” them.

In general, the following wattages are now available in the market for medium base A lamps:

Legacy wattage	New wattage*	Brightness*
100	72	1490 lumens
75	53	1050 lumens
60	43	750 lumens
40	29	380 lumens

\* Actual wattage and brightness will vary according to brand and finish (soft white, clear, etc.)

Underwriters Laboratories (UL) and the Canadian Standards Association (CSA) have not yet adopted standards to offer “certified” lamps in these new wattages to manufacturers for product testing. As a result, the values cited in this catalog still refer to the legacy wattages. Due to the growing number of choices of lamps available to consumers (LED, CFL, etc.), UL/ CSA have incorporated into their safety standard an accommodation. The modification allows for use of any of these lamp types – provided the wattage of the alternate lamp does not exceed the MAX rated wattage on the fixture label.

It is at our customers’ discretion to choose to install CFL/LED lamps. Customers should pay careful attention to the bulb manufacturer’s warning/caution statements on the packaging or printed on the lamp. For example, many lamps will indicate on the packaging that they cannot be used in an enclosed fixture, a photocell or with a dimmer.

It is an exciting time to be part of the lighting industry as we advance best practices and make these technological leaps. Progress Lighting is committed to providing safe products that deliver on our customers’ expectations of having beautiful, functional lighting products to choose from – for any style, budget or home application.

*Every effort has been made to ensure the accuracy of information in this catalog. Progress Lighting reserves the right to make product changes from time to time, without prior notification, which may change the information provided in this catalog. Errors brought to our attention will be corrected in subsequent issues.*

*UL Listed or Classified or CSA Certified unless otherwise noted.*

*Bulbs not included with fixtures unless specified. Specifications subject to change without notice.*

*Metal finishes not specified as “solid” have quality plated or painted finishes.*

*Finish representations are high resolution digital reproductions, and, while every effort has been made to render colors accurately, they may vary slightly from the actual product, especially hand-painted finishes, due to the nature of hand craftsmanship.*

*©Progress Lighting 2015  
All rights reserved.  
International Copyright Secured.*



