
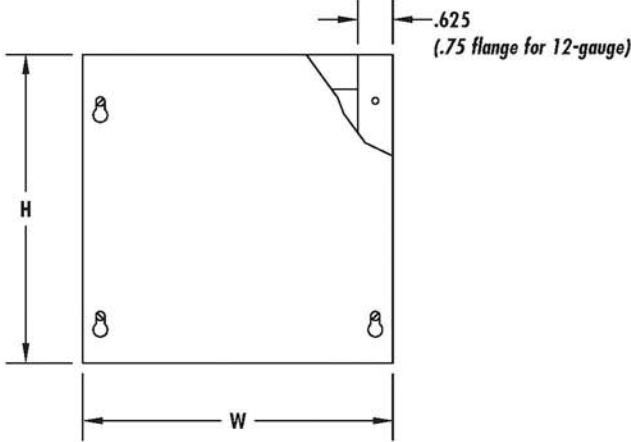



GALVANIZED AND PAINTED TYPE 1 BOXES

Screw Cover, Screw Cover w/KO's, Hinge Cover, Hinge Cover w/KO's

TYPE 1

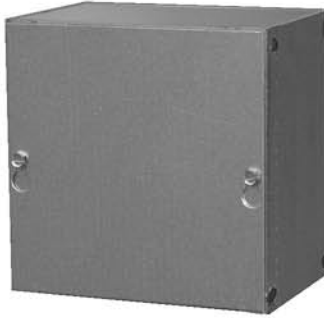

TYPE 1 SCREW COVER

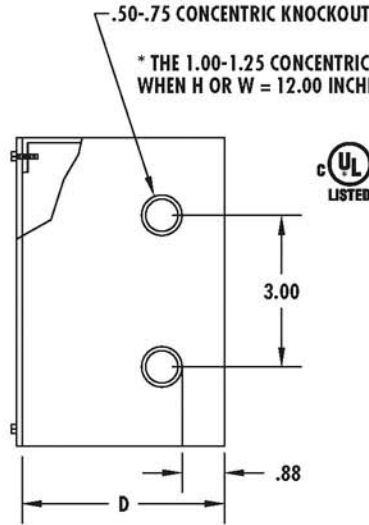

TYPE 1 SCREW COVER WITH KNOCKOUTS




CONSTRUCTION:


- CODE GAUGE G-90U GALVANIZED STEEL
- REMOVABLE COVER FASTENED WITH PLATED STEEL SCREWS
- KEYHOLE SCREW SLOTS IN THE COVER PERMIT THE REMOVAL OF THE COVER WITHOUT EXTRACTING THE SCREWS

FINISH:

- E-BOX TYPE 1 SCREW COVER BOXES ARE PROVIDED IN GALVANIZED G-90U OR ANSI 61 GRAY POLYESTER POWDER COATING INSIDE AND OUT OVER PAINT GRIP GALVANIZED STEEL

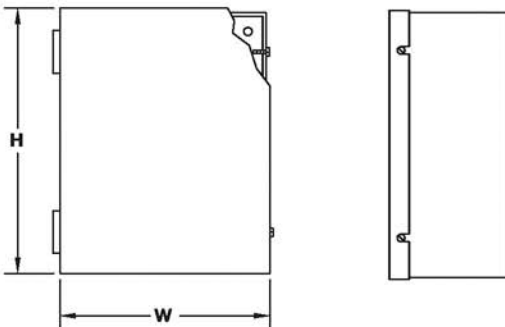

TYPE 1 HINGE SCREW COVER

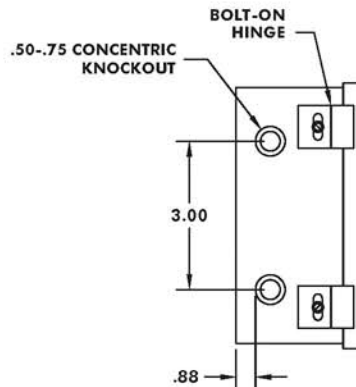

* THE 1.00-1.25 CONCENTRIC KNOCKOUT IS USED WHEN H OR W = 12.00 INCHES OR MORE. *



CONSTRUCTION:

- CODE GAUGE G-90U GRADE GALVANIZED STEEL
- HINGE COVERS ARE FASTENED WITH STEEL PLATED SCREWS
- BOLT-ON HINGE COVERS HAVE A FORMED STEEL ON SMALLER BOXES AND A BUTT HINGE ON LARGER HINGE BOXES

FINISH:

- E-BOX TYPE 1 SCREW COVER BOXES ARE PROVIDED IN GALVANIZED G-90U OR ANSI 61 GRAY POLYESTER POWDER COATING INSIDE AND OUT OVER PAINT GRIP GALVANIZED STEEL

GALVANIZED AND PAINTED TYPE 1 BOXES

Screw Cover, Screw Cover w/KO's, Hinge Cover, Hinge Cover w/KO's



TYPE
I

GALVANIZED

SC Suffix = Galvanized Screw Cover

NOTE: Replace "SC" suffix with:

SCKO Galvanized Screw cover w/KO's

HC Galvanized Hinge cover

HCKO Galvanized Hinge cover w/KO's

PAINTED

SC Suffix = Galvanized Screw Cover

NOTE: Replace "SC" suffix with:

SCP Painted Screw Cover

SCPKO Painted Screw cover w/KO's

HCP Painted Hinge cover

HCPKO Painted Hinge cover w/KO's

| Enclosure Size HxWxD | Catalog Number | Weight |
|----------------------|----------------|--------|
| 4x4x4 | 444SC | 2 |
| 6x4x4 | 644SC | 2 |
| 6x6x4 | 664SC | 3 |
| 8x6x4 | 864SC | 4 |
| 8x8x4 | 884SC | 5 |
| 10x6x4 | 1064SC | 5 |
| 10x8x4 | 1084SC | 5 |
| 10x10x4 | 10104SC | 7 |
| 12x6x4 | 1264SC | 6 |
| 12x8x4 | 1284SC | 6 |
| 12x10x4 | 12104SC | 7 |
| 12x12x4 | 12124SC | 9 |
| 15x12x4 | 15124SC | 11 |
| 15x15x4 | 15154SC | 14 |
| 16x16x4 | 16164SC | 16 |
| 18x12x4 | 18124SC | 13 |
| 18x15x4 | 18154SC | 16 |
| 18x18x4 | 18184SC | 17 |
| 24x12x4 | 24124SC | 15 |
| 24x18x4 | 24184SC | 23 |
| 24x24x4 | 24244SC | 35 |
| 30x24x4 | 30244SC | 43 |
| 36x24x4 | 36244SC | 51 |
| 6x6x6 | 666SC | 4 |
| 8x6x6 | 866SC | 5 |
| 8x8x6 | 886SC | 6 |
| 10x8x6 | 1086SC | 7 |
| 10x10x6 | 10106SC | 9 |
| 12x8x6 | 1286SC | 9 |
| 12x10x6 | 12106SC | 10 |
| 12x12x6 | 12126SC | 11 |
| 15x12x6 | 15126SC | 13 |
| 15x15x6 | 15156SC | 16 |
| 16x16x6 | 16166SC | 18 |
| 18x12x6 | 18126SC | 16 |
| 18x15x6 | 18156SC | 17 |
| 18x18x6 | 18186SC | 20 |
| 24x12x6 | 24126SC | 21 |
| 24x18x6 | 24186SC | 26 |
| 24x24x6 | 24246SC | 39 |
| 30x24x6 | 30246SC | 48 |
| 30x30x6 | 30306SC | 56 |
| 36x24x6 | 36246SC | 81 |
| 36x30x6 | 36306SC | 94 |
| * 36x36x6 | 36366SC | 110 |
| * 48x24x6 | 48246SC | 101 |
| * 48x36x6 | 48366SC | 128 |
| * 48x48x6 | 48486SC | 234 |

NOTE: * Size **not** available with KO'S

FOR LARGE QUANTITIES CALL FACTORY

Continue on next Page



GALVANIZED AND PAINTED TYPE 1 BOXES

Screw Cover, Screw Cover w/KO's, Hinge Cover, Hinge Cover w/KO's

TYPE
1

GALVANIZED

SC Suffix = Galvanized Screw Cover

NOTE: Replace "SC" suffix with:

SKCO Galvanized Screw cover w/KO's

HC Galvanized Hinge cover

HCKO Galvanized Hinge cover w/KO's

PAINTED

SC Suffix = Galvanized Screw Cover

NOTE: Replace "SC" suffix with:

SCP Painted Screw Cover

SCPKO Painted Screw cover w/KO's

HCP Painted Hinge cover

HCPKO Painted Hinge cover w/KO's

| Enclosure Size HxWxD | Catalog Number | Weight |
|----------------------|----------------|--------|
| 8x8x8 | 888SC | 7 |
| 10x10x8 | 10108SC | 10 |
| 12x12x8 | 12128SC | 12 |
| 15x12x8 | 15128SC | 15 |
| 15x15x8 | 15158SC | 17 |
| 18x12x8 | 18128SC | 17 |
| 18x15x8 | 18158SC | 20 |
| 18x18x8 | 18188SC | 23 |
| 24x12x8 | 24128SC | 23 |
| 24x18x8 | 24188SC | 29 |
| 24x24x8 | 24248SC | 42 |
| 30x24x8 | 30248SC | 51 |
| 30x30x8 | 30308SC | 88 |
| 36x24x8 | 36248SC | 60 |
| 36x30x8 | 36308SC | 102 |
| * 36x36x8 | 36368SC | 119 |
| 48x24x8 | 48248SC | 110 |
| * 48x36x8 | 48368SC | 159 |
| * 48x48x8 | 48488SC | 249 |
| 12x12x10 | 121210SC | 14 |
| 18x12x10 | 181210SC | 19 |
| 18x18x10 | 181810SC | 25 |
| 24x18x10 | 241810SC | 31 |
| 24x24x10 | 242410SC | 48 |
| 30x30x10 | 303010SC | 96 |
| 30x24x10 | 302410SC | 56 |
| 36x24x10 | 362410SC | 67 |
| 36x30x10 | 363010SC | 111 |
| * 36x36x10 | 363610SC | 128 |
| * 48x36x10 | 483610SC | 171 |
| * 48x48x10 | 484810SC | 265 |
| 12x12x12 | 121212SC | 16 |
| 18x12x12 | 181212SC | 21 |
| 18x18x12 | 181812SC | 28 |
| 24x12x12 | 241212SC | 27 |
| 24x18x12 | 241812SC | 34 |
| 24x24x12 | 242412SC | 53 |
| 30x30x12 | 303012SC | 103 |
| 36x24x12 | 362412SC | 70 |
| * 36x36x12 | 363612SC | 137 |
| * 48x36x12 | 483612SC | 179 |
| * 48x48x12 | 484812SC | 280 |

NOTE: * Size **not** available with KO'S

FOR LARGE QUANTITIES CALL FACTORY