


Brackenheath

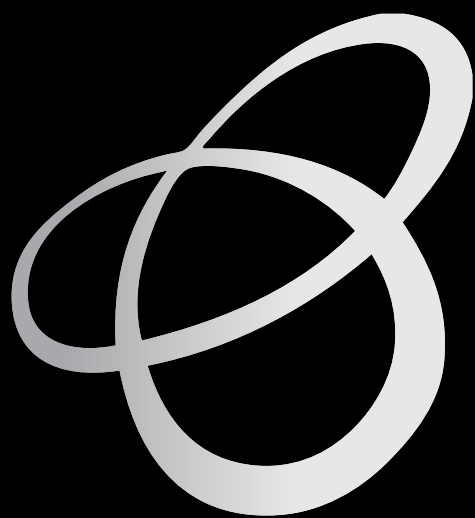

ispot[®]
driverless floodlight





ispot[®]

driverless floodlight

Unique ultra thin, stylish design is possible by using innovative high voltage LEDs and no driver



*High quality toughened glass
with attractive silver bezel*



*Smart engineered mounting
bracket allows the ispot to be
rotated through 360°*



*High grade aluminium and steel
construction, including hex head
bolts for additional security*



- ✓ **Zero maintenance - 36,000 hour rated life**
- ✓ **Over 90% energy saving against halogen**



10W ▶ 50W



FEATURES

- Innovative high voltage LED chips - no driver required
- Energy efficient super bright LED
- Daylight and Warm White options
- 100-110° beam angle
- High grade aluminium body
- Available in black and white finishes
- Attractive silver bezel
- Complete with mounting bracket and 900mm flex
- Rated life of 36,000 hours
- Beam angle – 105°
- Lumen output – 3200lm
- 230V

Wattage	Dimensions (mm)	Beam Angle	Lumen Output	Colour Temperature	Finish	Product Code
10W	152x130x25	105°	680lm	5700K	White	I1010W
10W	152x130x25	105°	680lm	5700K	Black	I1010B
10W	152x130x25	105°	640lm	3000K	White	I1011W
10W	152x130x25	105°	640lm	3000K	Black	I1011B
20W	213x180x28	100°	1500lm	5700K	White	I1020W
20W	213x180x28	100°	1500lm	5700K	Black	I1020B
20W	213x180x28	100°	1500lm	3000K	White	I1021W
20W	213x180x28	100°	1500lm	3000K	Black	I1021B
30W	275x265x38	110°	2000lm	5700K	White	I1030W
30W	275x265x38	110°	2000lm	5700K	Black	I1030B
30W	275x265x38	110°	2000lm	3000K	White	I1031W
30W	275x265x38	110°	2000lm	3000K	Black	I1031B
50W	275x265x38	105°	3200lm	5700K	White	I1040W
50W	275x265x38	105°	3200lm	5700K	Black	I1040B
50W	275x265x38	105°	3200lm	3000K	White	I1041W
50W	275x265x38	105°	3200lm	3000K	Black	I1041B




ispot[®] **sensor**

driverless floodlight



*7m range and 300° field of detection
reduces blind spots for added security*

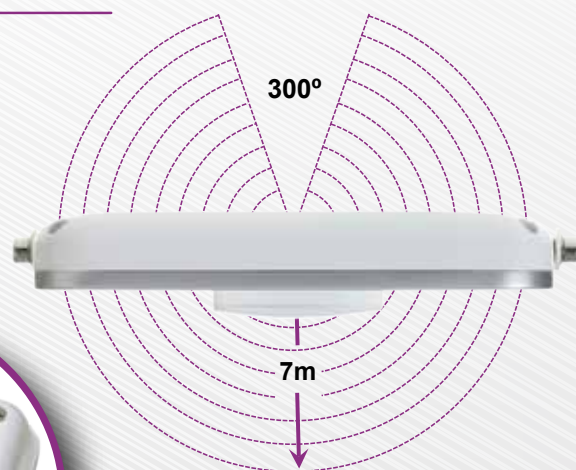

Microwave sensor provides increased sensitivity and larger detection range than conventional PIR sensors



Sensor arm allows tilting through 180°, providing greater flexibility when choosing the position of the ispot

- ✓ **Microwave sensor is weather resistant to IP65**
- ✓ **Built in daylight sensor with adjustable lux level**



ispot[®] **sensor 20W ▶ 50W** driverless floodlight



FEATURES

- Innovative high voltage LED chips - no driver required
- Energy efficient super bright LED
- Daylight and Warm White options
- 100-105° beam angle
- High grade aluminium body
- Available in black and white finishes
- Beam angle – 105
- Lumen output – 3200lm
- Complete with mounting bracket and 900mm flex
- Microwave sensor for optimum sensitivity
- Detection distance 7m
- Detection range 300°
- Rated life of 36,000 hours
- 230V

Wattage	Dimensions (mm)	Beam Angle	Lumen Output	Colour Temperature	Finish	Product Code
20W	213x180x28	100°	1500lm	5700K	White	I1025W
20W	213x180x28	100°	1500lm	5700K	Black	I1025B
20W	213x180x28	100°	1500lm	3000K	White	I1026W
20W	213x180x28	100°	1500lm	3000K	Black	I1026B
30W	275x265x38	110°	2000lm	5700K	White	I1035W
30W	275x265x38	110°	2000lm	5700K	Black	I1035B
30W	275x265x38	110°	2000lm	3000K	White	I1036W
30W	275x265x38	110°	2000lm	3000K	Black	I1036B
50W	275x265x38	105°	3200lm	5700K	White	I1045W
50W	275x265x38	105°	3200lm	5700K	Black	I1045B
50W	275x265x38	105°	3200lm	3000K	White	I1046W
50W	275x265x38	105°	3200lm	3000K	Black	I1046B



ispot[®] [C]

driverless floodlight

Unique ultra thin, stylish design is possible by using innovative high voltage LEDs and no driver



Distinctive domed lens provides optimum lumen output and beam angle up to 140°



Rear cable entry improves the appearance as the flex is not visible once installed



Zero maintenance – 30,000 hour rated life



Front and rear heat sink for enhanced heat dissipation



ispot[®] C 30W ▶ 80W

driverless floodlight



FEATURES

- Innovative high voltage LED chips - no driver required
- Energy efficient super bright LED
- Daylight colour temperature
- 70-140° beam angle
- High grade aluminium body
- Available in black and white finishes
- Attractive silver bezel
- Complete with mounting bracket and 900mm flex
- Rated life of 30,000 hours
- 230V

Wattage	Dimensions (mm)	Beam Angle	Lumen Output	Colour Temperature	Finish	Product Code
30W	198x168x36	70°	2100lm	5700K	White	I2010W
30W	198x168x36	70°	2100lm	5700K	Black	I2010B
50W	275x210x48	120°	3500lm	5700K	White	I2020W
50W	275x210x48	120°	3500lm	5700K	Black	I2020B
80W	320x246x48	140°	5600lm	5700K	White	I2030W
80W	320x246x48	140°	5600lm	5700K	Black	I2030B



Kingsway House
2-8 Laporte Way, Luton
Bedfordshire, England
LU4 8RJ

Telephone: +44 (0) 1582 544 590
Fax: +44 (0) 1582 544 591
email: sales@brackenheath.co.uk
www.brackenheath.co.uk

