





94.04

Approvals (according to type):





<b>Screw terminal (Box clamp) socket</b>	<b>94.02</b>	<b>94.02.0</b>	<b>94.03</b>	<b>94.03.0</b>	<b>94.04</b>	<b>94.04.0</b>
panel or 35 mm rail (EN 60715) mount	<b>Blue</b>	<b>Black</b>	<b>Blue</b>	<b>Black</b>	<b>Blue</b>	<b>Black</b>
For timer type	85.02		85.03		85.04	
<b>Accessories</b>						
Metal retaining clip (supplied with timer)	094.81					
6-way jumper link	094.06	094.06.0	094.06	094.06.0	094.06	094.06.0
Identification tag	094.00.4					
<b>Technical data</b>						
Rated values	10 A - 250 V					
Dielectric strength	2 kV AC					
Protection category	IP 20					
Ambient temperature	°C -40...+70					
⊕ Screw torque	Nm 0.5					
Wire strip length	mm 8					
Max. wire size for 94.02, 94.03 and 94.04 sockets	solid wire			stranded wire		
	mm <sup>2</sup> 1x6 / 2x2.5			1x4 / 2x2.5		
	AWG 1x10 / 2x14			1x12 / 2x14		

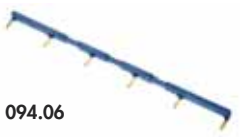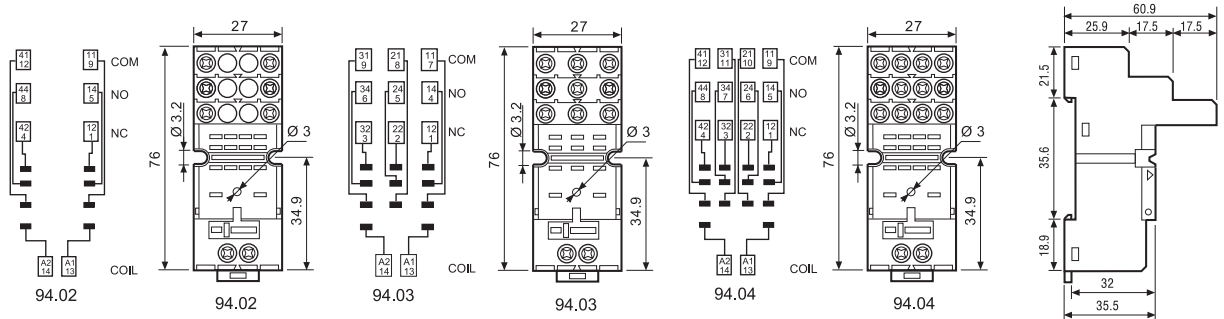

094.06

<b>6-way jumper link for 94.02, 94.03 and 94.04 sockets</b>	094.06 (blue)	094.06.0 (black)
Rated values	10 A - 250 V	

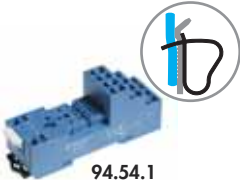
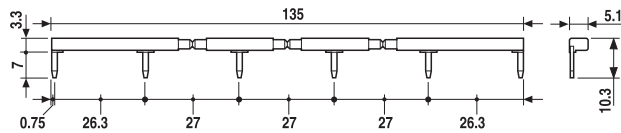



94.54.1

Approvals (according to type):




<b>Screwless terminal socket 35 mm rail (EN 60715) mount</b>	<b>94.54.1 (blue)</b>	<b>94.54.10 (black)</b>
For timer type	85.02, 85.04	
<b>Accessories</b>		
Metal retaining clip	094.81	
<b>Technical data</b>		
Rated values	10 A - 250 V	
Dielectric strength	2 kV AC	
Protection category	IP 20	
Ambient temperature	°C -25...+70	
Wire strip length	mm 7	
Max. wire size for 94.54.1 socket	solid wire	stranded wire
	mm <sup>2</sup> 2x(0.2...1.5)	2x(0.2...1.5)
	AWG 2x(24...18)	2x(24...18)

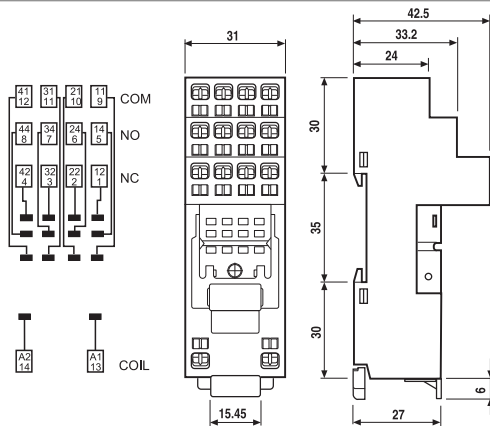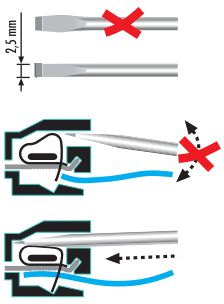

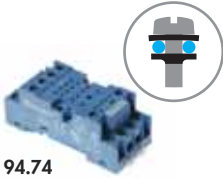

**94.74**

Approvals  
(according to type):

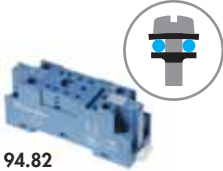



**94.82**

Approvals  
(according to type):




<b>Screw terminal (Plate clamp) socket</b> panel or 35 mm rail (EN 60715) mount	<b>94.72</b> <b>Blue</b>	<b>94.72.0</b> <b>Black</b>	<b>94.73</b> <b>Blue</b>	<b>94.73.0</b> <b>Black</b>	<b>94.74</b> <b>Blue</b>	<b>94.74.0</b> <b>Black</b>
For timer type	85.02		85.03		85.02, 85.04	
<b>Accessories</b>	Metal retaining clip (supplied with timer) 094.81					
<b>Screw terminal socket</b> panel or 35 mm rail (EN 60715) mount	<b>94.82</b> <b>Blue</b>				<b>94.82.0</b> <b>Black</b>	
For timer type	85.02		85.02			
<b>Accessories</b>	Metal retaining clip (supplied with timer) 094.81					
<b>Technical data</b>	Rated values 10 A - 250 V					
Dielectric strength	2 kV AC					
Protection category	IP 20					
Ambient temperature	°C -40...+70					
⊕ Screw torque	Nm 0.5					
Wire strip length	mm 8 (94.72, 94.73, 94.74); 9 (94.82)					
Max. wire size for 94.72, 94.73, 94.74 and 94.82 sockets	solid wire			stranded wire		
	mm <sup>2</sup> 1x2.5 / 2x1.5			1x2.5 / 2x1.5		
	AWG 1x14 / 2x16			1x14 / 2x16		

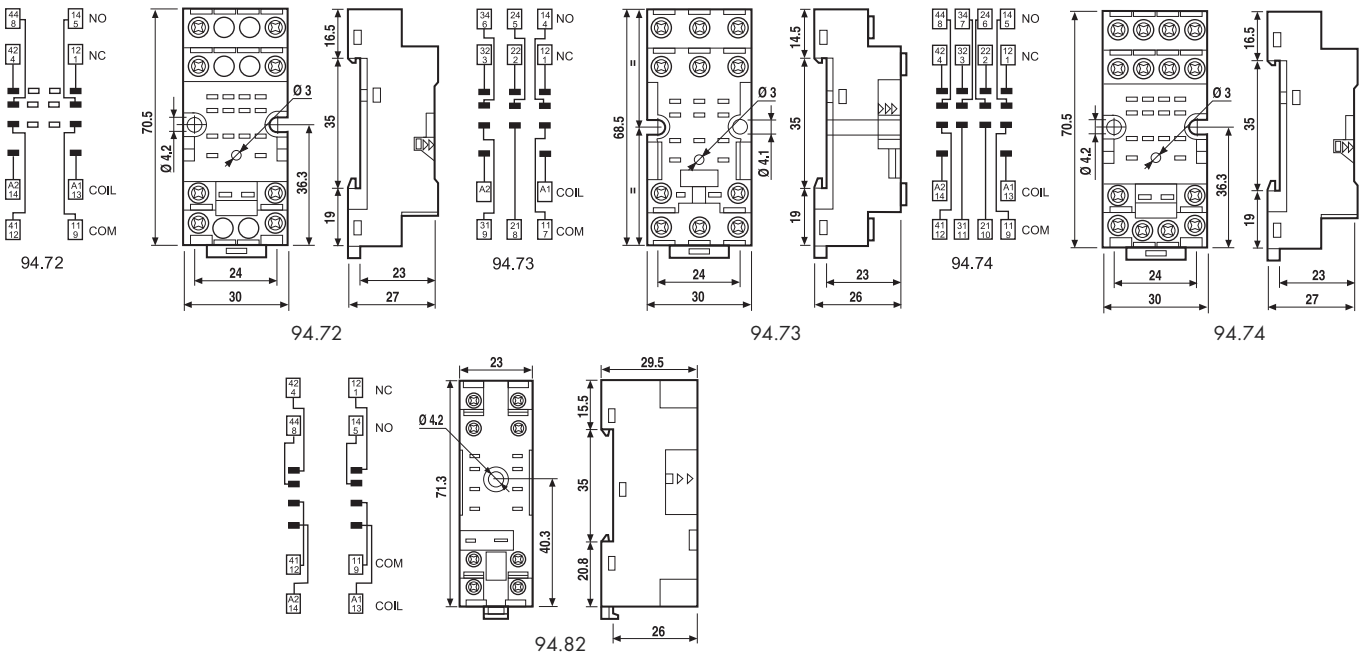

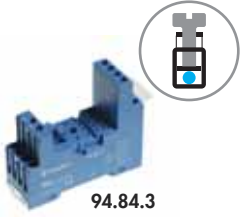

94.84.3

Approvals  
(according to type):






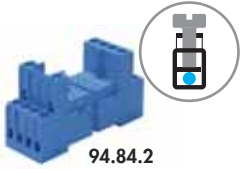


94.84.2

Approvals  
(according to type):




<b>Screw terminal (Box clamp) socket</b> panel or 35 mm rail (EN 60715) mount	<b>94.82.3</b> <b>Blue</b>	<b>94.82.30</b> <b>Black</b>	<b>94.84.3</b> <b>Blue</b>	<b>94.84.30</b> <b>Black</b>
For timer type	85.02		85.02, 85.04	
<b>Accessories</b>				
Metal retaining clip	094.81			
6-way jumper link	094.06	094.06.0	094.06	094.06.0
Identification tag	094.80.2			
<b>Screw terminal (Box clamp) socket</b> panel or 35 mm rail (EN 60715) mount	<b>94.84.2</b> <b>Blue</b>	<b>94.84.20</b> <b>Black</b>		
For timer type	85.02, 85.04			
<b>Accessories</b>				
Metal retaining clip	094.81			
6-way jumper link	094.06	094.06.0		
Identification tag	094.80.2			
<b>Technical data</b>				
Rated values	10 A - 250 V			
Dielectric strength	2 kV AC			
Protection category	IP 20			
Ambient temperature	°C -40...+70			
⊕ Screw torque	Nm 0.5			
Wire strip length	mm 7			
Max. wire size for 94.82.3, 94.84.3 and 94.84.2 sockets	solid wire		stranded wire	
	mm <sup>2</sup> 1x6 / 2x2.5		1x4 / 2x2.5	
	AWG 1x10 / 2x14		1x12 / 2x14	

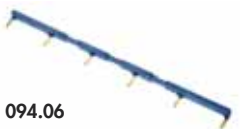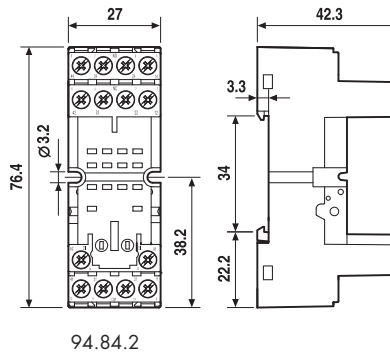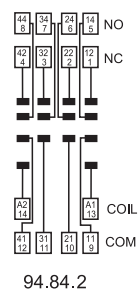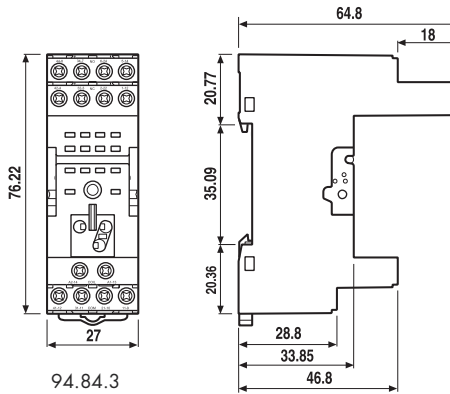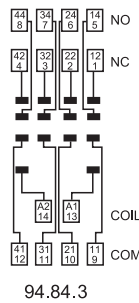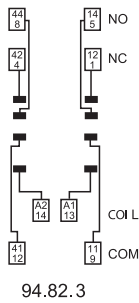

094.06

<b>6-way jumper link</b> for 94.82.3, 94.84.3 and 94.84.2 sockets	094.06 (blue)	094.06.0 (black)
Rated values	10 A - 250 V	

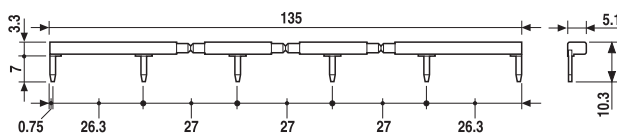





94.94.3

Approvals  
(according to type):



Screw terminal (Box clamp) socket	94.92.3	94.92.30	94.94.3	94.94.30
panel or 35 mm rail (EN 60715) mount	Blue	Black	Blue	Black
For timer type	85.02		85.02, 85.04	
<b>Accessories</b>				
Metal retaining clip	094.81			
6-way jumper link	094.06	094.06.0	094.06	094.06.0
Identification tag	094.80.2			
<b>Technical data</b>				
Rated values	10 A - 250 V			
Dielectric strength	2 kV AC			
Protection category	IP 20			
Ambient temperature	°C	-25...+70		
⊕ Screw torque	Nm	0.5		
Wire strip length	mm	8		
Max. wire size for 94.92.3 and 94.94.3 sockets	solid wire			stranded wire
	mm <sup>2</sup>	1x6 / 2x2.5		1x4 / 2x2.5
	AWG	1x10 / 2x14		1x12 / 2x14

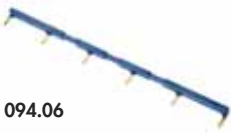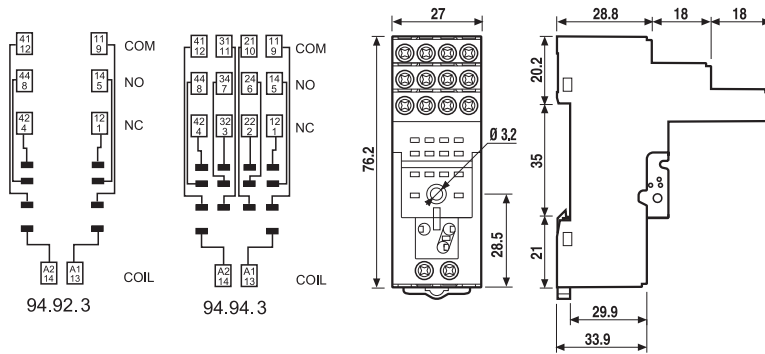

094.06

6-way jumper link for 94.92.3 and 94.94.3 sockets	094.06 (blue)	094.06.0 (black)
Rated values	10 A - 250 V	

