




BB15

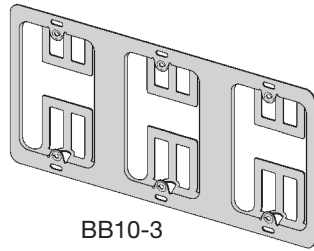


BB10-3

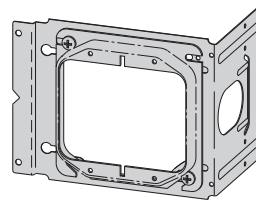


BB423-208

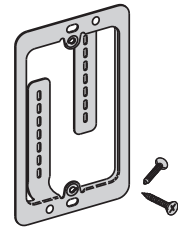


BB10L

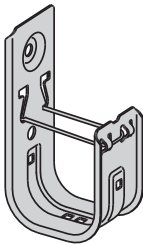


BCH32

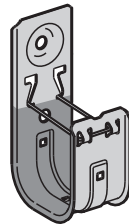


BCH32X

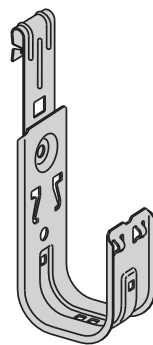


BCH32-F3 KIT

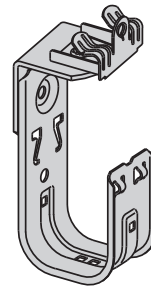


BCH32-U-5-8

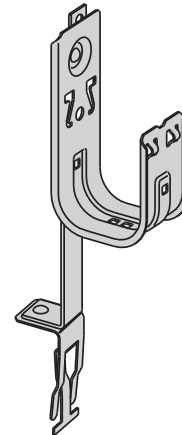


BCH32-A28

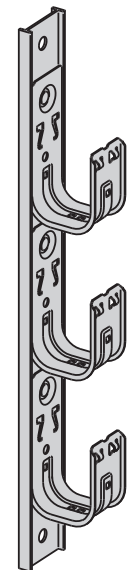


BCH32-3S

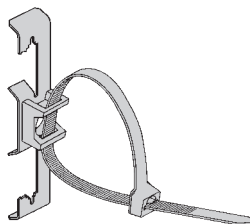


BW2-CT2

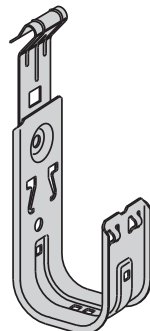


BCH32-F4

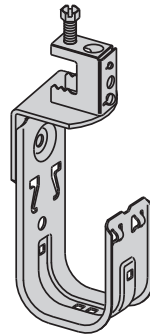


BCH32-C2

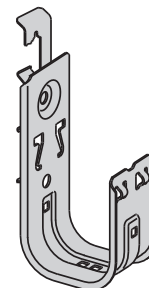


BCH32-W2

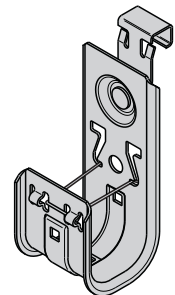


BCH32-SC4

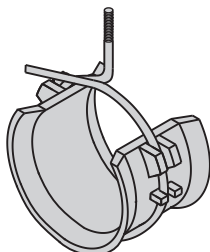


BRS-32A

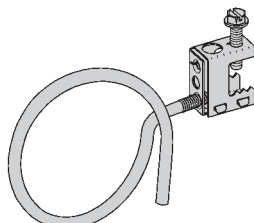


BCH-32-4T-C1

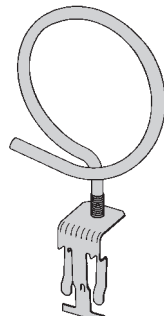

BCH-32-4T-A6

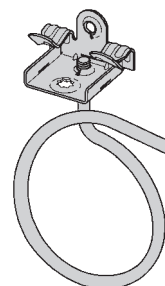

BR-32-4T-U-5-8

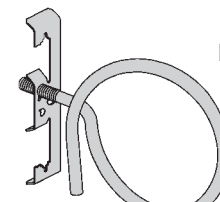

BR-32-4T-W2

Cooper B-Line spring steel fasteners offer unmatched quality and durability. Our fasteners are made of steel and are designed to provide superior strength and ease of installation.

The complete line of fasteners available from Cooper B-Line ensures that we have the ideal product for your application.

Choose Cooper B-Line fasteners for superior design and top-quality manufacturing.

Material:	Type	Thickness	Specifications
	Pre-Galvanized Steel		ASTM A653
	Electrolytic Zinc Coated Steel		ASTM A591
	High Carbon Cold Rolled Steel		ASTM A684, AISI 1055
	Stainless Steel		AISI Type 304


Finishes:	
	Pre-Galvanized ASTM A653
	Electro-Galvanized Zinc ASTM B633 SC3
	Zinc Phosphate. MIL-P-16232 Type Z

Table of Contents

Cover Plate Mounting Brackets	236, 239
Cover Plate Mounting Bracket, Uni-Mount	237
Cover Plate Mounting Bracket, Multi-Gang	238
Plastic Cover Plate Mounting Bracket	239
Cable Fasteners - Beam	240
Cable Fasteners - Drop Wire	240
Cable Hooks	241
Cable to Beam Fasteners - Horizontal Flanges	242 - 244
Cable to Beam Fasteners - Vertical Flanges	245
Cable to Beam Fasteners - Angled Flanges	245
Cable to Rod/Drop Wire Fasteners	246
Cable to T-Bar Fasteners	246
Cable to Floor Support Fasteners	247
Cable to ATR Fasteners	248
Angle Bracket Cable Fasteners	248
Low Friction Cable Hooks	249
Single-Sided Multi-Tier Cable Fasteners	250
Double-Sided Multi-Tier Cable Fasteners	251
Multi-Tier Attachment Kits	251
Aluminum & Steel Support Bars	252
Bridle Ring Saddles	253
Bridle Rings	253
Bridle Ring/Beam Fastener Assembly	253
Bridle Ring/Rod & Wire Fastener Assembly	254
Bridle Ring/T-Bar Fastener Assembly	254
Bridle Ring/Beam Fastener Assembly	254
KwikWire™ Clamps	255
KwikWire Wire Rope	255
KwikWire Cutter	255
KwikPak™ Kits	256
KwikWire Clamp Assemblies	257
KwikWire Accessories - Loop Termination	259
KwikWire Accessories - Hook Termination	260 - 261
KwikWire Accessories - Toggle Termination	262 - 263
KwikWire Accessories - Bolt Termination	264 - 265
KwikWire Accessories - Bracket Termination	266

Cover Plate Mounting Bracket

- Provides attachment base for low voltage outlets: antenna, audio, computer, telephone, and security
- Locates communication outlets before drywall is installed
- Attaches to metal studs with screws (not included)
- Replaces electrical box in Class 2 low voltage installations
- For 1/2" (12.7mm) and 5/8" (15.9mm) drywall applications
- Finish: Pre-galvanized
- Box Quantity - 25

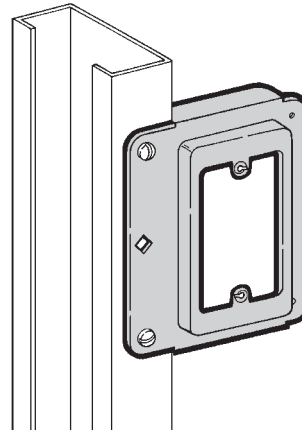


Part Number	Wt. Per 100	
	Lbs.	(kg)
BB15	13.8	(6.2)

✓ Popular item

Cover Plate Mounting Bracket




- Provides attachment base for low voltage outlets: antenna, audio, computer, telephone, and security
- Locates communication outlets before drywall is installed
- Attaches to metal studs with screws (not included)
- Heavy-duty double gang design with far side support
- Finish: Pre-galvanized
- Box Quantity - 25

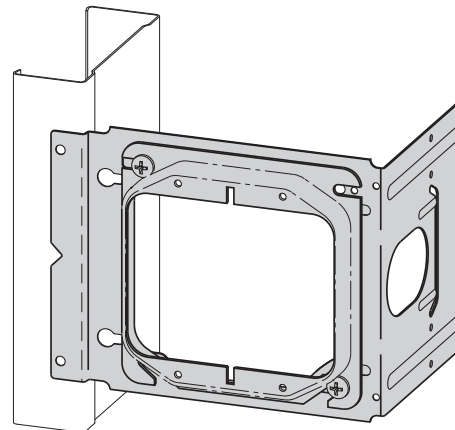

Part Number	Drywall Thickness		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
BB423-208	1/2"	(13)	32.0	(14.5)
BB423-210	5/8"	(16)	35.2	(15.9)

Uni-Mount™ Box Support/Cover Plate Mounting Brackets


- Uni-Mount™ offers a secure box support for 4" square boxes and features a built-in plaster ring
- Rigid bracket design eliminates the need for far-side support
- Replaces electrical boxes in Class 2 low voltage installations
- Guide tabs ensure consistent alignment on studs
- Finish: Pre-galvanized
- Box Quantity - 50

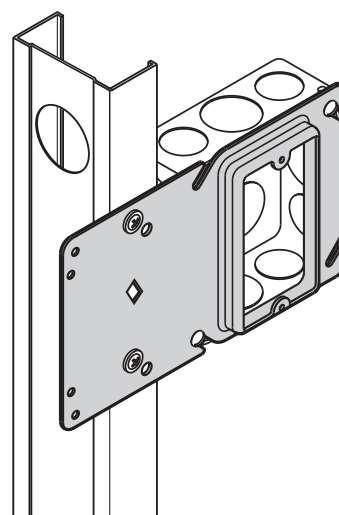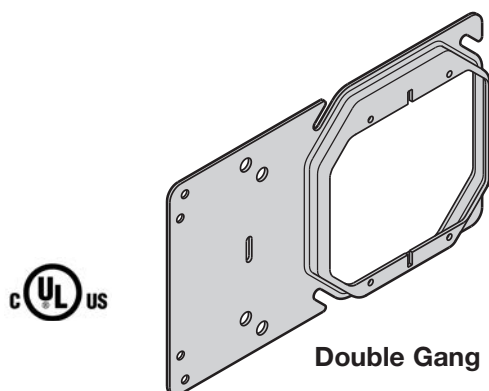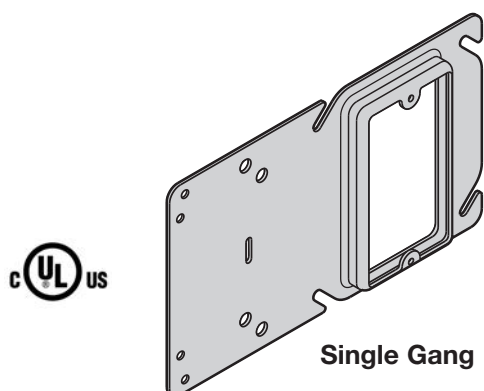


Part Number	Description	Wt. Per 100	
		Lbs.	(kg)
Single Gang			
BB40-8	1/2" Raise	46.0	(20.8)
BB40-10	5/8" Raise	46.0	(20.8)
BB40-12	3/4" Raise	50.0	(22.7)
Double Gang			
BB45-8	1/2" Raise	38.0	(17.2)
BB45-10	5/8" Raise	39.2	(17.8)
BB45-12	3/4" Raise	40.4	(18.3)

Cover Plate Mounting Brackets


- Replaces electrical box in Class 2 low voltage installations
- Provides attachment base for low voltage outlets: antenna, audio, computer, telephone and security
- New BB10 series design accepts Decora® style cover plates
- Maximum 1¹/₄" (31.7mm) drywall thickness
- Finish: Pre-galvanized
- Box Quantity: BB10 - 50
All Others - 10

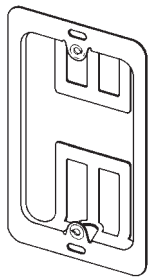



BB10

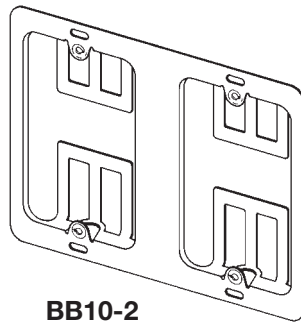


BB10-2

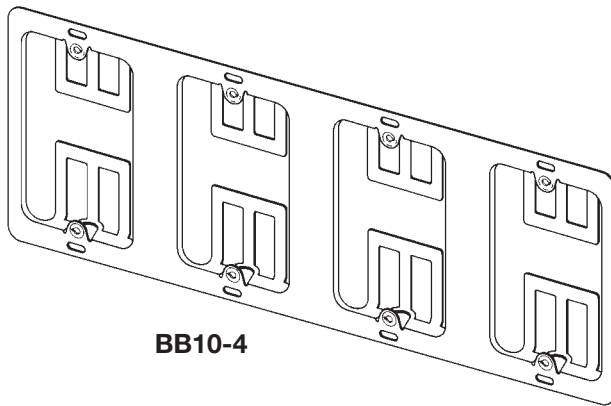

BB10-4

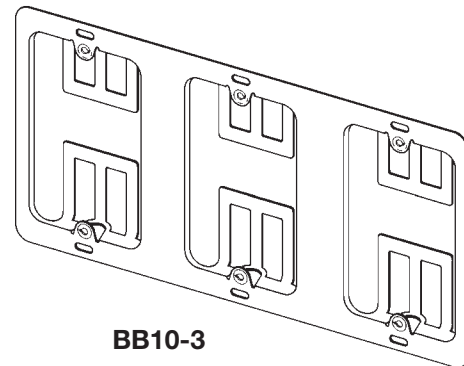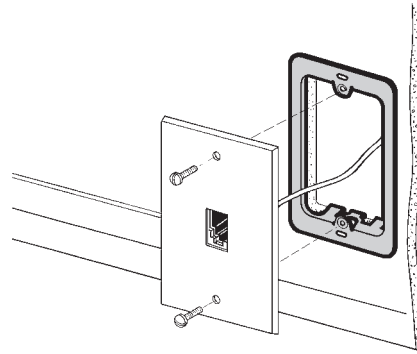

BB10-3

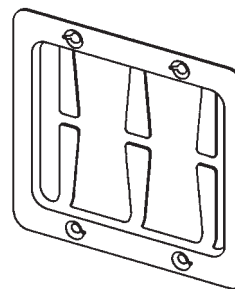

BB20

Part Number	Description	Wt. Per Pc.	
		Lbs.	(kg)
✓ BB10	Single Gang Bracket	6.8	(3.1)
BB10-2	Mounts 2 Single Plates	14.0	(6.3)
BB10-3	Mounts 3 Single Plates	21.0	(9.5)
BB10-4	Mounts 4 Single Plates	28.0	(12.7)
BB20	Double Gang Bracket	8.0	(3.6)


✓ Popular item





Decora® is a registered trademark of Leviton Manufacturing Co., Inc.

Cover Plate Mounting Brackets

- Replaces electrical box in Class 2 low voltage installations
- Provides attachment base for low voltage outlets: antenna, audio, computer, telephone and security
- Provides rigid support when installed with screws that are provided
- Maximum 1¹/₄" (31.7mm) drywall thickness
- Finish: Pre-galvanized
- Box Quantity - 50

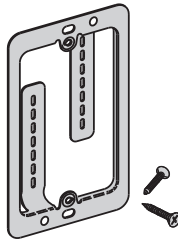

BB10L

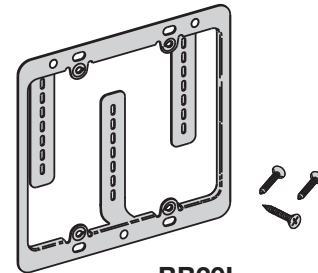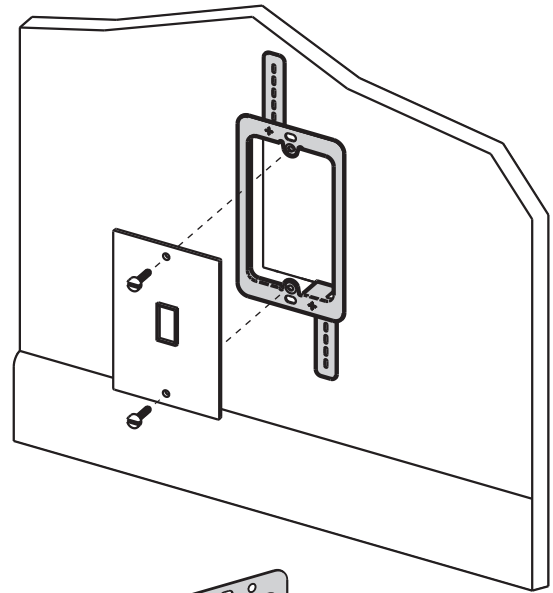



BB20L

Part Number	Description	Wt. Per Pc.	
		Lbs.	(kg)
✓ BB10L	Single Gang Bracket	7.6	(3.4)
BB20L	Double Gang Bracket	10.4	(4.7)

✓ Popular item

Plastic Cover Plate Mounting Bracket

- Provides attachment base for low voltage outlets
- Replaces electrical box in Class 2 low voltage installations
- Design eliminates sharp edges from bracket
- Maximum wall thickness: 3/4" (19.0mm)
- Box Quantity - 50

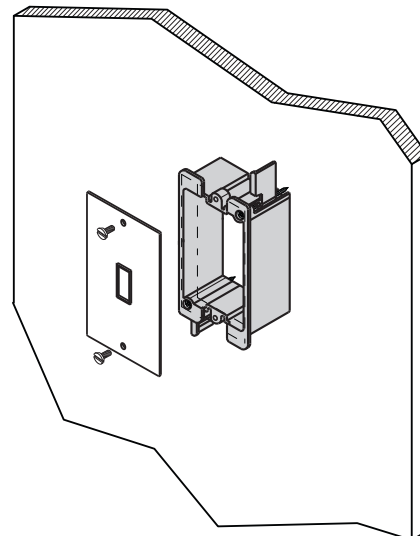
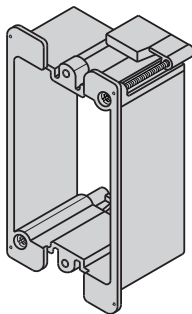


Part Number	Wt. Per 100	
	Lbs.	(kg)
✓ BB10P	6.0	(2.7)


✓ Popular item

Cable Fasteners


- Supports cable ties up to $\frac{9}{32}$ " (7.1mm) wide from flanges $\frac{1}{16}$ " (1.6mm) to $\frac{3}{4}$ " (19.0mm)
- Designed for securing communications cables
- 8" (203mm) cable tie included
- Simply installed with a hammer
- Finish: Zinc Phosphate
- Box Quantity - 100

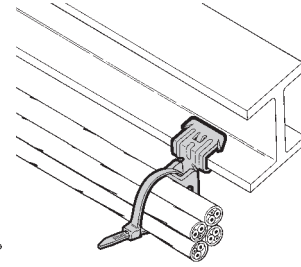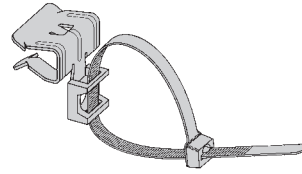

BE-__-__-CT2

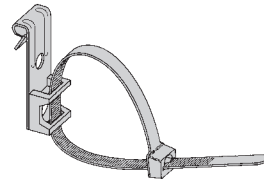



BF__-CT2

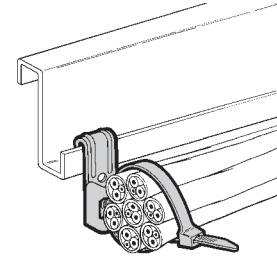

Part Number	Description		Wt. Per 100 Lbs. (kg)	
BE-2-4-CT2	$\frac{1}{8}$ " to $\frac{1}{4}$ "	(3.2 to 6.3)	4.4	(2.0)
BE-5-8-CT2	$\frac{5}{16}$ " to $\frac{1}{2}$ "	(7.9 to 12.7)	4.8	(2.2)
BE-9-12-CT2	$\frac{5}{16}$ " to $\frac{1}{2}$ "	(7.9 to 12.7)	5.4	(2.4)
BF1-CT2	$\frac{1}{16}$ " to $\frac{5}{32}$ "	(1.6 to 3.9)	3.6	(1.6)
BF2-CT2	$\frac{5}{32}$ " to $\frac{1}{4}$ "	(3.9 to 6.3)	3.6	(1.6)

Cable Fasteners

- Supports cable ties up to $\frac{9}{32}$ " (7.1mm) wide from drop wires
- Designed for securing communications cables
- 8" (203mm) cable tie included
- Finish: Zinc Phosphate
- Box Quantity - 100

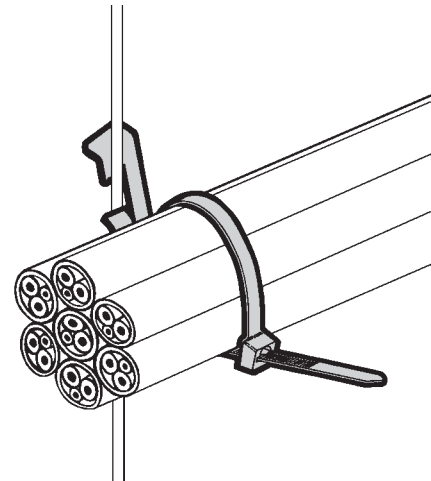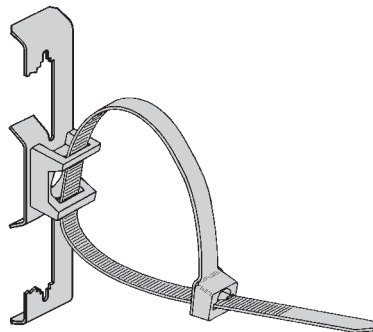


Part Number	Description	Wt. Per 100 Lbs. (kg)	
BW2-CT2	#12 Wire thru $\frac{1}{4}$ " Plain Rod"	3.9	(1.7)
BW6-CT2	$\frac{3}{8}$ " Plain or Threaded Rod"	4.5	(2.0)


Cable Hooks

- Supports all category 5/5e/6, fiber optic, innerduct, and low voltage cabling requirements
- Finish is Pre-Galvanized Steel
- Static Load Capacity: 30 Lbs. (13.6kg)
- Exclusive Qwik-Latch™ cable retainers provide secure containment of cables and are included in each box of cable hooks
- Quick open and close design for adding and removing cable runs
- Plenum-rated Qwik-Latch is more economical than plenum-rated cable ties
- Box Quantity: BCH12, BCH21, and BCH32 - 50 • BCH64 - 25


BCH12

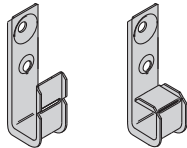


Bendable
Retaining Tab

 

BCH21

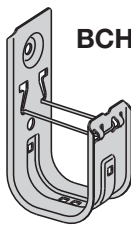


BCH32

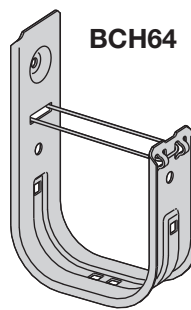

BCH64

Patent #5961081

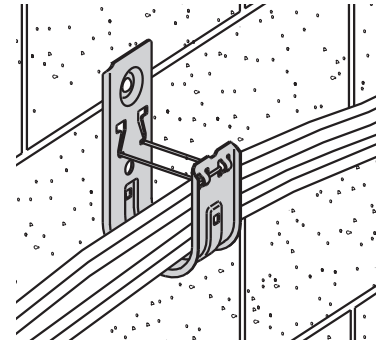

	Part Number	Hook Size In. (mm)	Capacity	Wt. Per 100 Lbs. (kg)	
✓	BCH12	3/4" (19.0)	16 4-Pair UTP	7.0	(3.2)
✓	BCH21	1 5/16" (33.3)	50 4-Pair UTP	15.4	(7.0)
✓	BCH32	2" (50.8)	80 4-Pair UTP	20.6	(9.3)
✓	BCH64	4" (101.6)	300 4-Pair UTP	56.0	(25.4)

✓ Popular item

Painted Cable Hooks

- Powder coated cable hooks are available in a range of colors to help meet your cable identification requirements.
- Standard riveted assemblies are available with painted cable hooks.
- Part numbers can be made by adding the paint color suffix after the cable hook part number
- Minimum order quantity 500 pieces.
- Standard lead time is 5-10 working days.

Colors

Bright White - BW
Brown - BR
Computer White - CW
Equipment Blue - BL
Flat Black - FB

Green - GR
Orange - OR
Regal Red - RR
Safety Yellow - YL
Telcom Gray - TG



Part # Example:

Painted Cable Hook Part Number - BCH32BW
Painted Cable Hook Assembly - BCH32BW-U24



Cable To Beam Fasteners

- Permits fast and easy installation on beam flanges
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a hammer
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50 • BCH64 - 25

Part Number	Hook Size		Flange Thickness		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
✓ BCH12-U-2-4	3/4"	(19.0)	1/8" to 1/4"	(3.2 to 6.3)	35.0	(15.9)
BCH12-U-5-8	3/4"	(19.0)	5/16" to 1/2"	(7.9 to 12.7)	36.0	(16.3)
BCH12-U-9-12	3/4"	(19.0)	9/16" to 3/4"	(14.3 to 19.0)	37.0	(16.8)
✓ BCH21-U-2-4 *	15/16"	(33.3)	1/8" to 1/4"	(3.2 to 6.3)	40.4	(18.3)
BCH21-U-5-8 *	15/16"	(33.3)	5/16" to 1/2"	(7.9 to 12.7)	40.2	(18.2)
BCH21-U-9-12 *	15/16"	(33.3)	9/16" to 3/4"	(14.3 to 19.0)	42.6	(19.3)
✓ BCH32-U-2-4 *	2"	(50.8)	1/8" to 1/4"	(3.2 to 6.3)	44.6	(20.2)
BCH32-U-5-8 *	2"	(50.8)	5/16" to 1/2"	(7.9 to 12.7)	46.4	(21.0)
BCH32-U-9-12 *	2"	(50.8)	9/16" to 3/4"	(14.3 to 19.0)	46.8	(21.2)
BCH64-U-2-4 *	4"	(101.6)	1/8" to 1/4"	(3.2 to 6.3)	98.0	(44.4)
BCH64-U-5-8 *	4"	(101.6)	5/16" to 1/2"	(7.9 to 12.7)	96.0	(43.5)
BCH64-U-9-12 *	4"	(101.6)	9/16" to 3/4"	(14.3 to 19.0)	97.2	(44.1)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-U-5-8

✓ Popular item

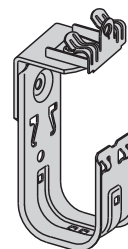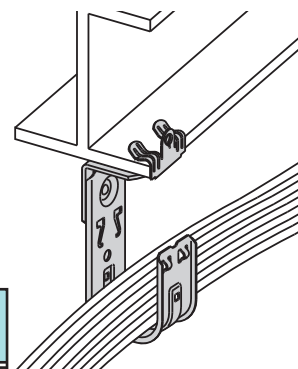

Allows 360° Rotation





Cable To Beam Fasteners

- Permits fast and easy installation on beam flanges
- Qwik-Latch cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a hammer
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12 and BCH21 - 50 • BCH32 - 25

Part Number	Hook Size		Flange Thickness		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH12-E-2-4	3/4"	(19.0)	1/8" to 1/4"	(3.2 to 6.3)	11.0	(5.0)
BCH12-E-5-8	3/4"	(19.0)	5/16" to 1/2"	(7.9 to 12.7)	11.0	(5.0)
BCH12-E-9-12	3/4"	(19.0)	9/16" to 3/4"	(14.3 to 19.0)	12.0	(5.4)
BCH21-E-2-4 *	15/16"	(33.3)	1/8" to 1/4"	(3.2 to 6.3)	18.4	(8.3)
BCH21-E-5-8 *	15/16"	(33.3)	5/16" to 1/2"	(7.9 to 12.7)	22.6	(10.2)
BCH21-E-9-12 *	15/16"	(33.3)	9/16" to 3/4"	(14.3 to 19.0)	19.8	(9.0)
✓ BCH32-E-2-4 *	2"	(50.8)	1/8" to 1/4"	(3.2 to 6.3)	23.8	(10.8)
BCH32-E-5-8 *	2"	(50.8)	5/16" to 1/2"	(7.9 to 12.7)	24.4	(11.0)
BCH32-E-9-12 *	2"	(50.8)	9/16" to 3/4"	(14.3 to 19.0)	24.6	(11.1)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-E-5-8



✓ Popular item

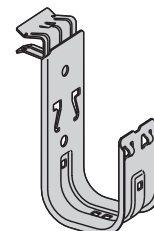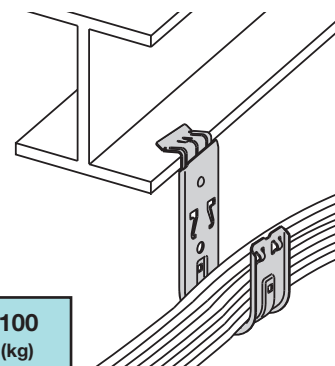

† Mark shown is property of respective owner.

Cable To Beam Fasteners

- 360° rotation allows cable to run in any direction
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a screwdriver
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

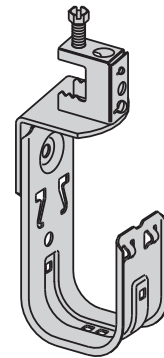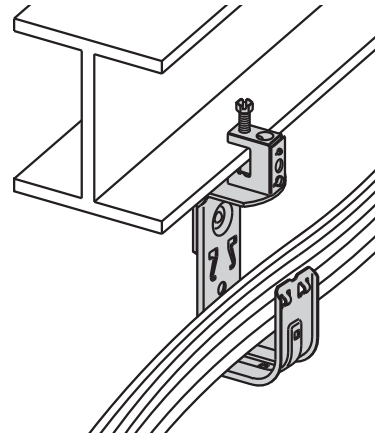

Part Number	Hook Size		Flange Thickness	Wt. Per 100	
	In.	(mm)		Lbs.	(kg)
BCH12-C2	3/4"	(19.0)	Thru 1/2" (13mm)	17.4	(7.9)
✓ BCH21-C2 *	1 5/16"	(33.3)	Thru 1/2" (13mm)	39.8	(18.0)
✓ BCH32-C2 *	2"	(50.8)	Thru 1/2" (13mm)	45.0	(20.4)
✓ BCH64-C2 *	4"	(101.6)	Thru 1/2" (13mm)	95.6	(43.3)



* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-C2

✓ Popular item



Cable To Beam Fasteners

- 360° rotation allows cable to run in any direction
- Qwik-Latch cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a screwdriver
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

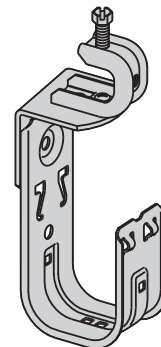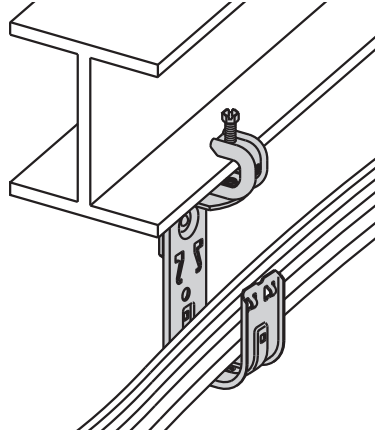

Part Number	Hook Size		Flange Thickness		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH12-C442	3/4"	(19.0)	1/8" - 5/8"	(3 - 16)	23.5	(10.6)
✓ BCH21-C442 *	1 5/16"	(33.3)	1/8" - 5/8"	(3 - 16)	45.8	(20.8)
BCH32-C442 *	2"	(50.8)	1/8" - 5/8"	(3 - 16)	51.6	(23.4)
BCH64-C442 *	4"	(101.6)	1/8" - 5/8"	(3 - 16)	102.4	(46.6)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-C442


✓ Popular item



† Mark shown is property of respective owner.


Cable To Beam Fasteners

- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a screwdriver
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

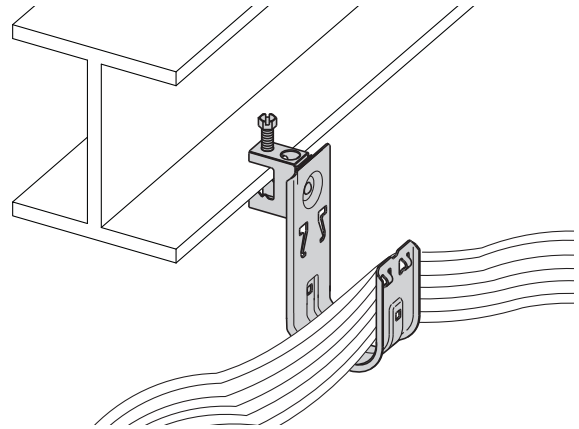


Part Number	Hook Size		Flange Thickness	Wt. Per 100	
	In.	(mm)		Lbs.	(kg)
BCH12-C1	3/4"	(19.0)	Thru 1/2" (13mm)	12.3	(5.6)
BCH21-C1 *	1 5/16"	(33.3)	Thru 1/2" (13mm)	20.7	(9.4)
BCH32-C1 *	2"	(50.8)	Thru 1/2" (13mm)	25.9	(11.7)
BCH64-C1 *	4"	(101.6)	Thru 1/2" (13mm)	61.3	(27.8)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-C1

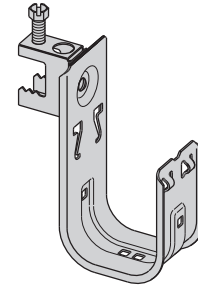


Cable To Beam Fasteners

- Qwik-Latch cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a screwdriver
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

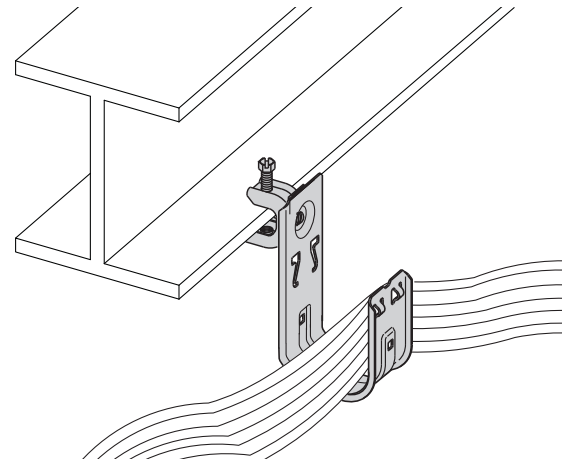

Part Number	Hook Size		Flange Thickness	Wt. Per 100	
	In.	(mm)	In. (mm)	Lbs.	(kg)
BCH12-C442A	3/4"	(19.0)	1/8" - 5/8" (3 - 16)	18.4	(8.3)
BCH21-C442A *	1 5/16"	(33.3)	1/8" - 5/8" (3 - 16)	26.8	(12.1)
BCH32-C442A *	2"	(50.8)	1/8" - 5/8" (3 - 16)	32.0	(14.5)
BCH64-C442A *	4"	(101.6)	1/8" - 5/8" (3 - 16)	67.4	(30.6)



* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-C442A

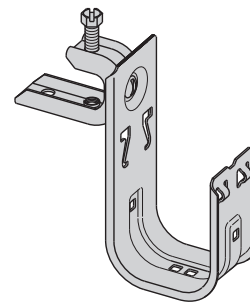

† Mark shown is property of respective owner.

Cable To Flange Fasteners

- Supports cable from vertical flanges
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a hammer
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

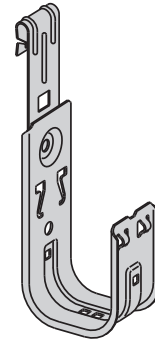
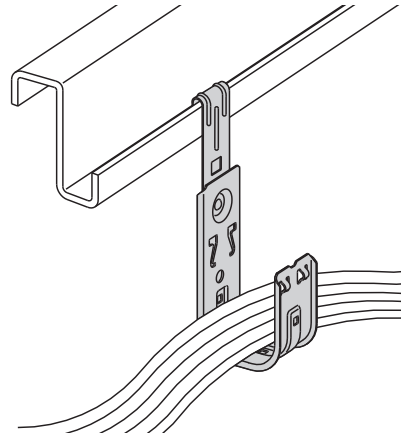


Part Number	Hook Size		Flange Thickness		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH12-F3	3/4"	(19.0)	1/16" - 1/4"	(1.6 - 6.3)	13.0	(5.9)
BCH21-F3 *	1 5/16"	(33.3)	1/16" - 1/4"	(1.6 - 6.3)	21.0	(9.5)
BCH32-F3 *	2"	(50.8)	1/16" - 1/4"	(1.6 - 6.3)	26.0	(11.8)
BCH64-F3 *	4"	(101.6)	1/16" - 1/4"	(1.6 - 6.3)	62.4	(28.3)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-F3

Cable To Flange Fasteners

- Supports cable from angled flanges
- Qwik-Latch cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Simply installed with a hammer
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

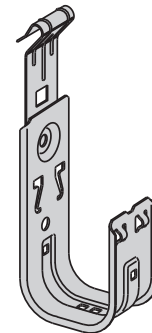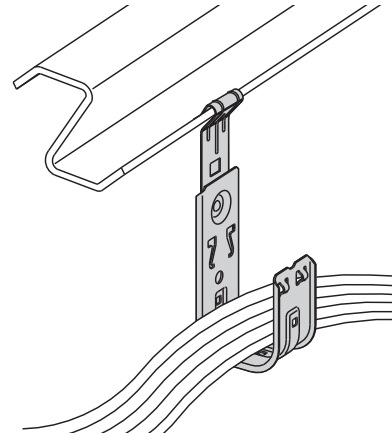

Part Number	Hook Size		Flange Thickness		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH12-F4	3/4"	(19.0)	1/16" - 1/4"	(1.6 - 6.3)	13.0	(5.9)
BCH21-F4 *	1 5/16"	(33.3)	1/16" - 1/4"	(1.6 - 6.3)	21.0	(9.5)
BCH32-F4 *	2"	(50.8)	1/16" - 1/4"	(1.6 - 6.3)	25.8	(11.7)
BCH64-F4 *	4"	(101.6)	1/16" - 1/4"	(1.6 - 6.3)	62.4	(28.3)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-F4

Patent #5961081

† Mark shown is property of respective owner.



Cable To Rod Fasteners

- Supports cable from #12 wire thru $\frac{3}{8}$ " threaded rod
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Static Load Capacity: 25 Lbs. (11.3kg)
- W2 series attaches to #12 wire thru $\frac{1}{4}$ " plain or threaded rod
- W6 series attaches to $\frac{3}{8}$ " plain or threaded rod
- Box Quantity - 50

	Part Number	Hook Size		Wt. Per 100	
		In.	(mm)	Lbs.	(kg)
✓	BCH12-W2	$\frac{3}{4}$ "	(19.0)	10.0	(4.5)
✓	BCH21-W2 *	$1\frac{5}{16}$ "	(33.3)	17.6	(8.0)
✓	BCH32-W2 *	2"	(50.8)	23.4	(10.6)
	BCH12-W6	$\frac{3}{4}$ "	(19.0)	10.0	(4.5)
	BCH21-W6 *	$1\frac{5}{16}$ "	(33.3)	17.8	(8.1)
	BCH32-W6 *	2"	(50.8)	23.6	(10.7)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-W6

✓ Popular item

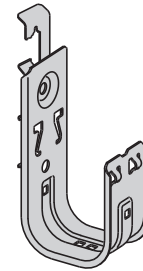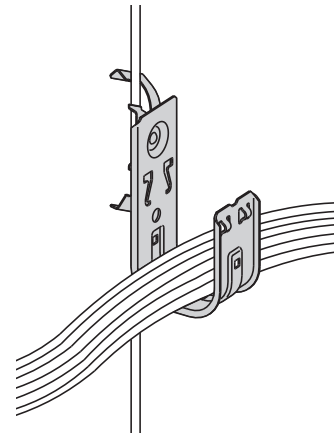



Cable To T-Bar Fasteners

- Supports cable above ceiling grid
- Qwik-Latch cable retainers included (not shown on drawings)
- Designed to accept cable ties
- 360° rotation allows cable to run in any direction
- Provides compliance with 1997 EIA/TIA standard 569-A
- Permits dropwire attachment if required
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity - 50

	Part Number	Hook Size		Wt. Per 100	
		In.	(mm)	Lbs.	(kg)
	BCH12-A28	$\frac{3}{4}$ "	(19.0)	23.0	(10.4)
	BCH21-A28 *	$1\frac{5}{16}$ "	(33.3)	30.6	(13.9)
	BCH32-A28 *	2"	(50.8)	36.8	(16.7)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-A28

† Mark shown is property of respective owner.

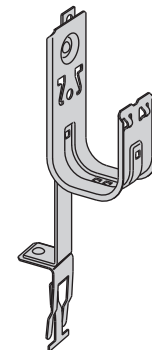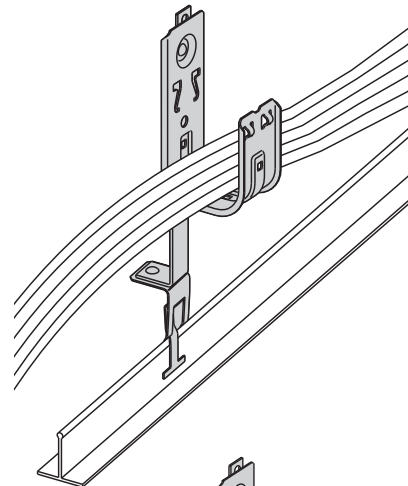


Cable To Floor Support Fasteners

- Supports cable from computer floor post
- Organizes cable off the floor for a neat installation
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Static Load Capacity: 30 Lbs. (13.6kg)
- Finish: Pre-galvanized
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

Part Number	Hook Size - Floor Post Size	Wt. Per 100	
		Lbs.	(kg)
BCH12-L1410	3/4" - 1" O.D.	13.4	(6.1)
BCH21-L1410	1 5/16" - 1" O.D.	22.8	(10.3)
✓ BCH32-L1410	2" - 1" O.D.	28.4	(12.9)
BCH64-L1410	4" - 1" O.D.	64.0	(29.0)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-L1410

✓ Popular item

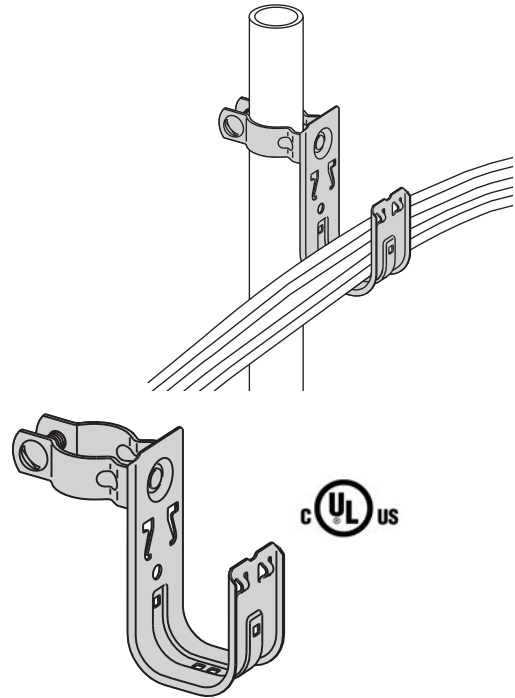

SPRING STEEL
FASTENERS


Cable To Floor Support Fasteners

- Supports cable from square computer floor post
- Organizes cable off the floor for a neat installation
- Qwik-Latch cable retainers included (not shown on drawings)
- Static Load Capacity: 30 Lbs. (13.6kg)
- Finish: Pre-galvanized
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

Part Number	Hook Size - Floor Post Size	Wt. Per 100	
		Lbs.	(kg)
BCH12-G-8-12	3/4" - 1" Square	13.4	(6.1)
✓ BCH21-G-8-12	1 5/16" - 1" Square	22.8	(10.3)
BCH32-G-8-12	2" - 1" Square	28.4	(12.9)
BCH64-G-8-12	4" - 1" Square	64.0	(29.0)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-G-8-12

✓ Popular item


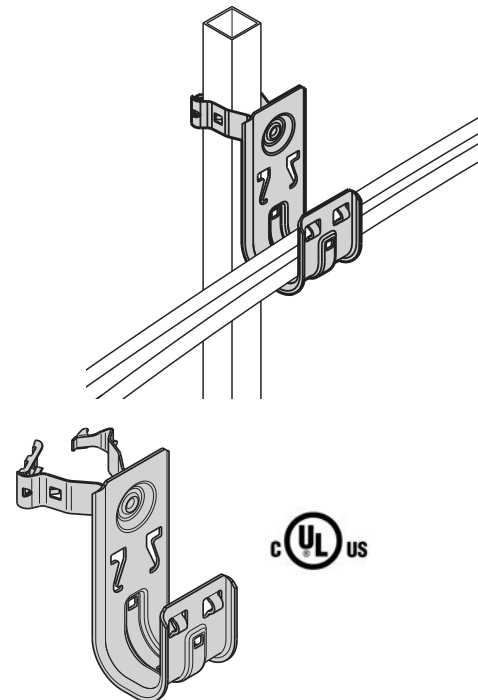


† Mark shown is property of respective owner.

Spring Steel Fasteners

Cable To ATR Fasteners

- .505" (12.8mm) diameter hole designed to support cable from 3/8" or 1/2" threaded rod
- Allows back-to-back and multi-tier installations
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH21 and BCH32 - 50
BCH64 - 25

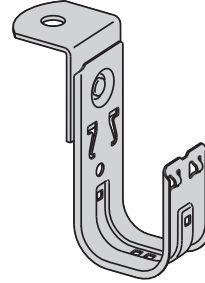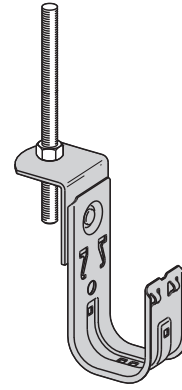

Note: Part numbers listed are for galvanized hooks - Add "SS4" for Stainless Steel.



Part Number	Hook Size		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
✓ BCH21-AB *	15/16"	(33.3)	34.2	(15.5)
✓ BCH32-AB *	2"	(50.8)	40.0	(18.1)
✓ BCH64-AB *	4"	(101.6)	91.2	(41.3)

* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-AB

✓ Popular item

Angle Bracket Cable Fasteners

- Designed for direct attachment to structures
- Supports cable from 1/4" threaded rod
- .265" (6.7mm) diameter hole accepts anchors, screws or common nails
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity: BCH12, BCH21, and BCH32 - 50
BCH64 - 25

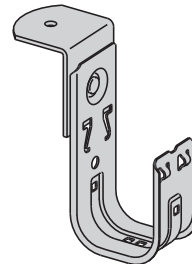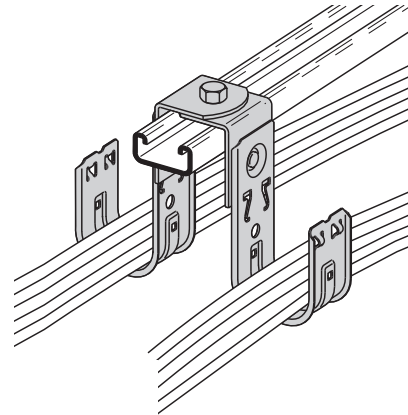

Note: Part numbers listed are for galvanized hooks - Add "SS4" for Stainless Steel.

Part Number	Hook Size		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
✓ BCH12-RB	3/4"	(19.0)	29.0	(13.2)
✓ BCH21-RB *	15/16"	(33.3)	34.4	(15.6)
✓ BCH32-RB *	2"	(50.8)	39.4	(17.9)
✓ BCH64-RB *	4"	(101.6)	91.2	(41.3)



* For Xylan®† coating, add "X" after cable hook part number. Ex: BCH32X-RB

✓ Popular item

† Mark shown is property of respective owner.

X-Hook Low Friction Cable Hooks

- Xylan^{®†} coating provides smooth frictionless surface for cable pulling
- Great for use in corners, drop-outs or any direction change in the cable run
- X-Hook has lower coefficient of friction than Teflon^{®†}
- Includes Quik-Latch cable retainer
- Box Quantity: BCH21X and BCH32X - 50
BCH64X - 25

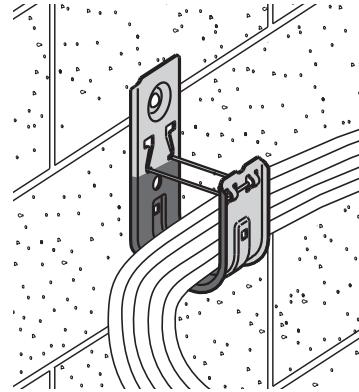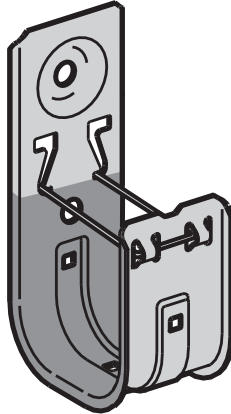

New Xylan coating reduces cable friction. Ideal for pulling cable.



Cable rollers are too expensive and require installation and removal.


Part Number	Hook Size		Capacity	Wt. Per 100	
	In.	(mm)		Lbs.	(kg)
BCH21X	1 ⁵ / ₁₆ "	(33.3)	50 4-Pair UTP	15.4	(7.0)
BCH32X	2"	(50.8)	80 4-Pair UTP	20.6	(9.3)
BCH64X	4"	(101.6)	300 4-Pair UTP	56.0	(25.4)

Available with most fastener assemblies. See the following pages.


† Marks shown are property of respective owners.

Single-Sided Multi-Tier Cable Fasteners

- Factory assembled multi-tier fasteners increase installation flexibility
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Available in two-tier through six-tier assemblies
- Unique design prevents hooks and assembly from rotating when pulling cable
- All support bars furnished in 6063-T6 aluminum
- Static Load Capacity: 30 Lbs. (13.6kg)
- Box Quantity - 10

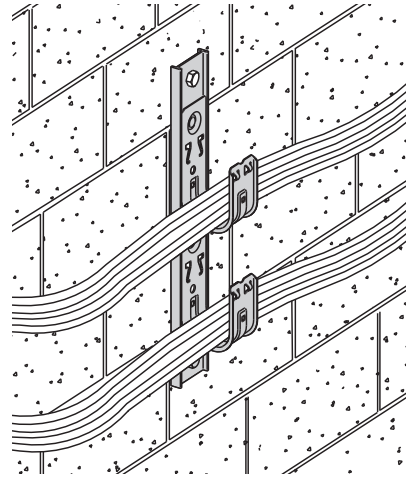


Part Number	Hook Size		Overall Height		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH21-2S	1 ⁵ / ₁₆ "	(33.3)	11"	(279)	65.0	(29.5)
BCH32-2S	2"	(50.8)	12 ³ / ₄ "	(324)	78.0	(35.4)
BCH64-2S	4"	(101.6)	19 ⁵ / ₁₆ "	(490)	94.0	(42.6)
BCH21-3S	1 ⁵ / ₁₆ "	(33.3)	14 ³ / ₄ "	(374)	99.0	(44.9)
BCH32-3S	2"	(50.8)	17 ¹ / ₂ "	(444)	122.0	(55.3)
BCH64-3S	4"	(101.6)	28 ¹ / ₁₆ "	(713)	148.0	(67.1)
BCH21-4S	1 ⁵ / ₁₆ "	(33.3)	18 ¹ / ₂ "	(470)	133.0	(60.3)
BCH32-4S	2"	(50.8)	21 ³ / ₄ "	(552)	166.0	(75.3)
BCH21-5S	1 ⁵ / ₁₆ "	(33.3)	21 ³ / ₄ "	(552)	167.0	(75.7)
BCH32-5S	2"	(50.8)	27"	(686)	182.0	(82.5)
BCH21-6S	1 ⁵ / ₁₆ "	(33.3)	26"	(660)	201.0	(91.2)
BCH32-6S	2"	(50.8)	31 ³ / ₄ "	(806)	222.0	(100.7)

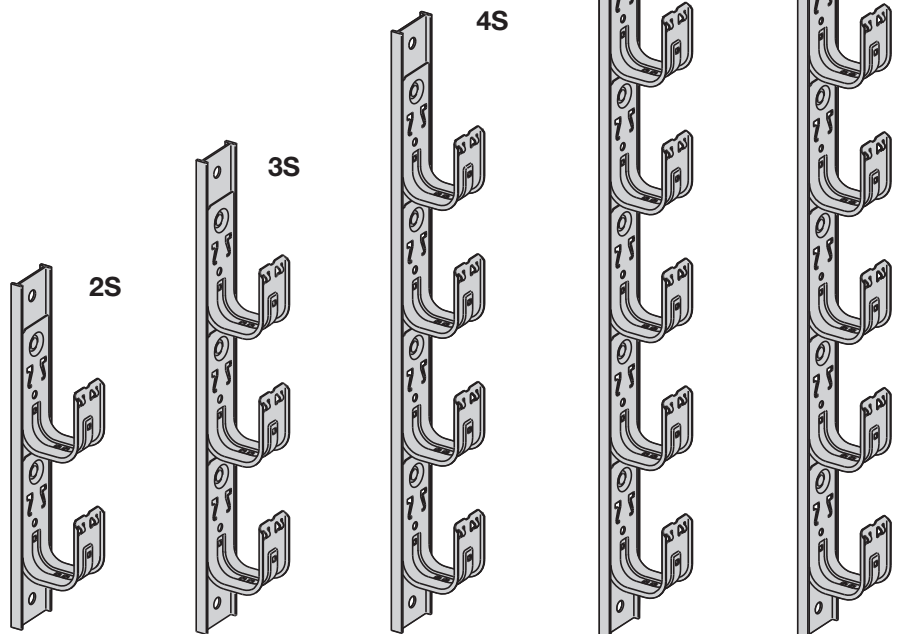

Double-Sided Multi-Tier Cable Fasteners


- Factory assembled multi-tier fasteners increase installation flexibility
- Unique design prevents hooks and assembly from rotating when pulling cable
- All support bars furnished in 6063-T6 aluminum
- Shown (at right) with optional BCHK2 kit
- Qwik-Latch™ cable retainers included (not shown on drawings)
- Designed to accept cable ties
- Static Load Capacity: (per hook) 30 Lbs. (13.6kg)
- Box Quantity: BCH21-1D and BCH32-1D - 20
BCH64-1D and All 2D Fasteners - 10

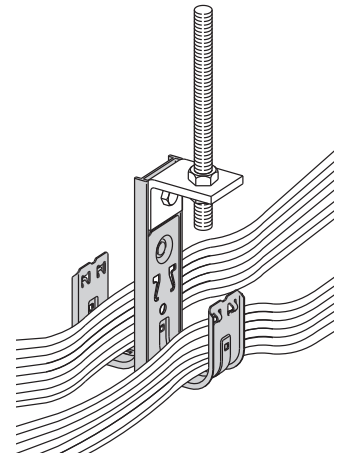

SPRING STEEL
FASTENERS

Part Number	Hook Size		Overall Height		Wt. Per 100	
	In.	(mm)	In.	(mm)	Lbs.	(kg)
BCH21-1D	1 ⁵ / ₁₆ "	(33.3)	5 ¹ / ₂ "	(140)	46.0	(20.8)
BCH32-1D	2"	(50.8)	6 ³ / ₁₆ "	(157)	63.0	(28.6)
BCH64-1D	4"	(101.6)	9"	(228)	144.0	(65.3)
BCH21-2D	1 ⁵ / ₁₆ "	(33.3)	9 ¹ / ₄ "	(234)	101.0	(45.8)
BCH32-2D	2"	(50.8)	11"	(279)	112.0	(50.8)
BCH64-2D	4"	(101.6)	18 ¹ / ₄ "	(463)	287.0	(130.2)

Note: Part numbers listed above are for galvanized hooks - Add "SS4" for Stainless Steel or add "H" for Zinc-Plated Spring Steel for heavy-duty applications.



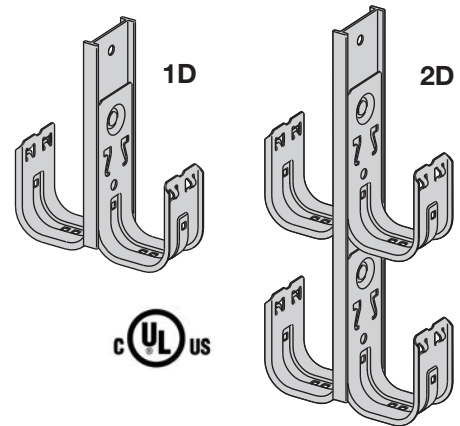


Patent #5961081

Multi-Tier Attachment Kits

- Kits permit secure attachment of single-tier and multi-tier fasteners.
- BCHK1 includes:
 - 1 ea. beam clamp (B444-1/4)
 - 1 ea. 1/4"-20 x 1/2" hex head cap screw
- BCHK2 includes:
 - 1 ea. angle bracket (with .320"Ø and .390"Ø holes)
 - 1 ea. 5/16"-18 x 3/4" hex head cap screw
 - 1 ea. 5/16"-18 hex nut
- BCHK3 includes:
 - 1 ea. BCHK1 Kit
 - 1 ea. BCHK2 Kit
- Box Quantity - 10


Part Number	Flange Thickness		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
BCHK1	thru 5/8"	(thru 15.9)	27.0	(12.2)
BCHK2	--	--	43.0	(19.5)
BCHK3	thru 5/8"	(thru 15.9)	67.0	(30.4)

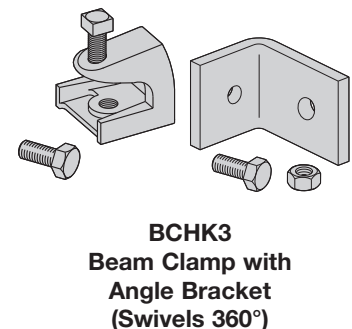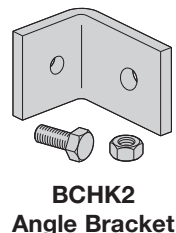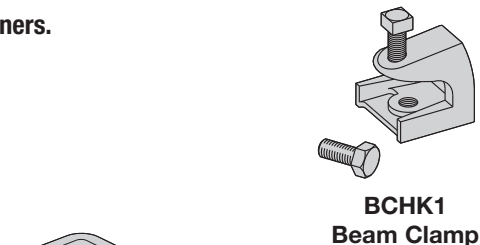

Steel Support Bar

- Furnished in zinc plated steel.
- BCH-HBA will tier up to (2) BCH64 cable hooks on each side or up to (3) BCH21 or BCH32 cable hooks on each side.
- BCH-HBA can be supported from $\frac{1}{4}$ ", $\frac{5}{16}$ " and $\frac{3}{8}$ " rod.
- Load Capacity: 180 Lbs. (81.6kg)
- Box Quantity - 40


Part Number	Support Bar For	Wt. Per 100	
		Lbs.	(kg)
BCH-HBA	BCH21, BCH32 & BCH64	25.1	(11.4)

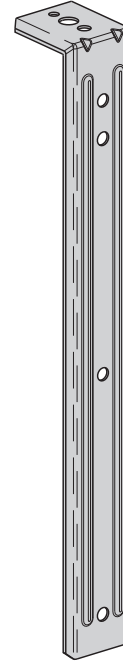

Aluminum Support Bars


- Furnished in 6063-T6 aluminum
- Box Quantity - 50

Part Number	Support Bar For	Wt. Per 100	
		Lbs.	(kg)
BCH-HB21	BCH21 & BCH32 8 $\frac{1}{4}$ " (209mm) long with .281"Ø (7.1mm) holes	23.0	(10.4)
BCH-HB64	BCH64 13 $\frac{5}{16}$ " (338mm) long with .281"Ø (7.1mm) holes	47.0	(21.3)

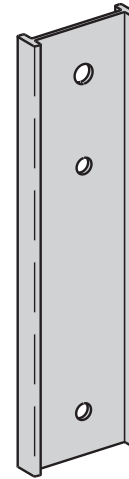


Bridle Ring Saddles


- The convenience of a bridle ring with the cable-bearing surface of a hook
- 2" (51mm) saddle is available separately
- Can be easily attached before or after cable installation
- Box Quantity: BRS-32A and BRS-32 - 50
BRS 64A - 25

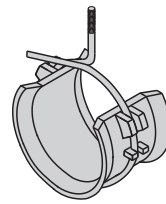

BRS-32A

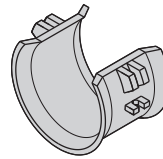

BRS-32

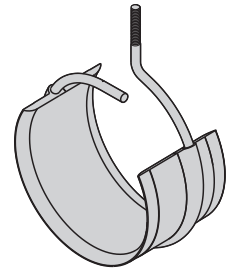


BRS-64A




Part Number	Thread Size x Description	Wt. Per 100	
		Lbs.	(kg)
BRS-32A	1/4"-20 x 7/8" 2" Ring Assembly	13.0	(5.89)
BRS-64A	1/4"-20 x 1" 4" Ring Assembly	30.0	(13.61)
BRS-32	2" Saddle Only	3.0	(1.36)

✓ Popular item

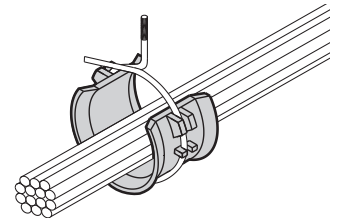


Threaded Bridle Rings

- Supports low voltage communication cables from wood beams
- Ultimate Load Capacity: 50 Lbs. (22.7kg)
- Finish: Zinc Plated
- Box Quantity - 100

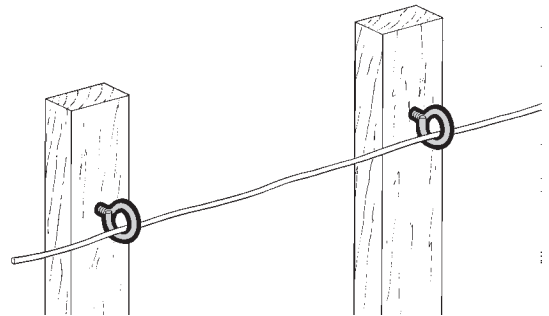

Part Number	Ring Size		Thread Size/Length	Wt. Per 100	
	In.	(mm)		Lbs.	(kg)
BR-16-3W	1"	(25.4)	3/16" x 9/16"	2.6	(1.18)
BR-24-4W	1 1/2"	(38.1)	1/4" x 27/32"	7.1	(3.22)
BR-32-4W	2"	(50.8)	1/4" x 7/8"	10.9	(4.94)


✓ Popular item

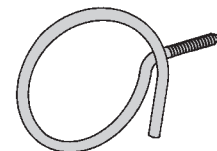

Bridle Ring/Beam Fastener Assembly

- Supports low voltage communication cables from beam flanges 1/8" (3.2mm) to 3/4" (19.0mm) thick
- Pre-assembled with 2" (51mm) bridle ring
- Reduces installation time
- Static Load Capacity: 15 Lbs. (6.8kg)
- Box Quantity - 50


Part Number	Flange Thickness		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
BR-32-4T-U-2-4	1/8" to 1/4"	(3.2 to 6.3)	14.6	(6.6)
BR-32-4T-U-5-8	5/16" to 1/2"	(7.9 to 12.7)	15.2	(6.9)
BR-32-4T-U-9-12	9/16" to 3/4"	(14.3 to 19.0)	16.6	(7.5)

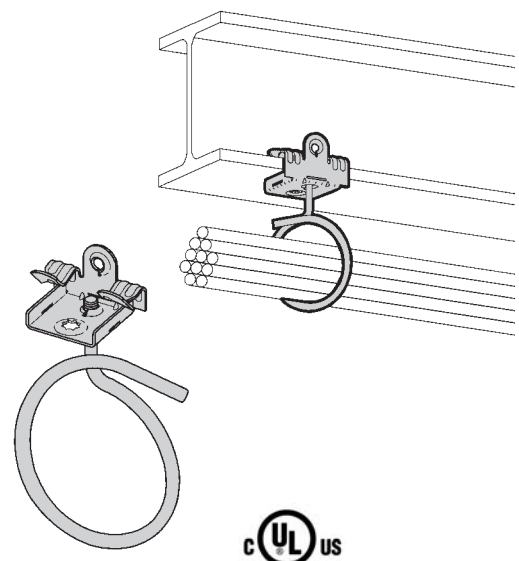

Bridle Ring/Rod & Wire Fastener Assy.

- Supports low voltage communication cables from drop wire
- Pre-assembled with 2" (51mm) bridle ring
- Reduces installation time
- Static Load Capacity: 15 Lbs. (6.8kg)
- Box Quantity - 50


Part Number	Wire or Rod Size	Wt. Per 100	
		Lbs.	(kg)
BR-32-4T-W2	#12 Wire thru 1/4" Plain or Threaded Rod	12.4	(5.6)

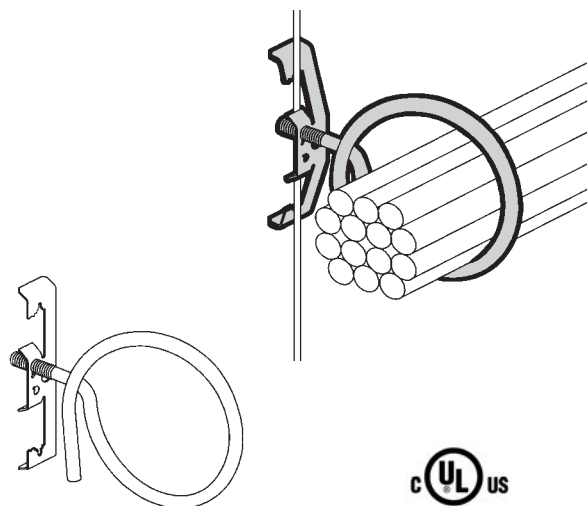

Bridle Ring/T-Bar Fastener Assy.

- Supports low voltage communication cables from the T-Bar
- Pre-assembled with 2" (51mm) bridle ring
- Reduces installation time
- For positioning only - No Load Rating
- Box Quantity - 50


Part Number Saddle Only	Ring Size		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
BR-32-4T-A6	2"	(50.8)	11.6	(5.2)

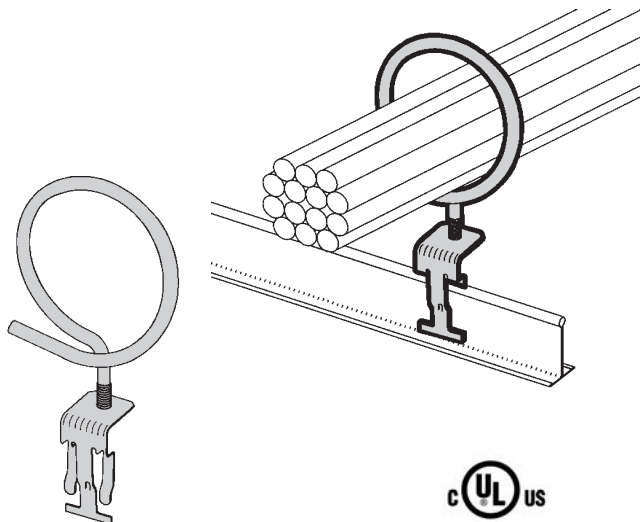

Bridle Ring/Beam Fastener Assy.

- Supports low voltage communication cables from beam flanges thru 1/2" (12.7mm) thick
- Pre-assembled with 2" (51mm) bridle ring
- Reduces installation time
- Static Load Capacity: 15 Lbs. (6.8kg)
- Box Quantity - 50

Part Number Saddle Only	Ring Size		Wt. Per 100	
	In.	(mm)	Lbs.	(kg)
BR-32-4T-C1	2"	(50.8)	15.0	(6.8)

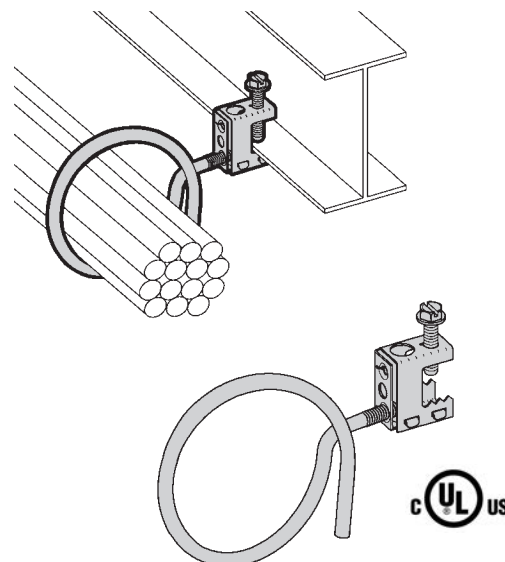

KwikWire™ Clamps

- KwikWire system replaces jack chain or ATR to support lighting, ductwork, cable tray, etc.
- Can be quickly installed around beams - No drilling required.
- Ideal for sloped ceilings - can hang objects at up to 60° angles.
- Simple height adjustments are made by releasing locking tab, no tools required.
- Spools of wire can be cut to length in field, reducing waste and up front planning.



KwikWire Clamp Working Loads*

Clamp Part No.	Wire Rope Dia.	Lbs. Safety Factor 5
BKC100	1/16"	0-75
BKC100	3/32"	25-150
BKC200	1/8"	25-250
BKC200	3/16"	50-640

Part Number	For Use With Wire Rope Diameters	Box Qty.
BKC100	1/16" & 3/32"	100
BKC200	1/8" & 3/16"	50

* Working loads shown are for hanging vertically.

For suspending at 15°, 30°, 45° or 60° angles from vertical, use the following percentage of the working loads from the chart:

15° = 96%
30° = 86%
45° = 70%
60° = 50%

KwikWire™ Wire Rope

- Finish: Uncoated Galvanized Wire



Part Number	Rope Dia. In. (mm)	Working Load Lbs. (kN)	Spool Qty. Ft. (m)
BKW063 (1)	1/16" (1.59)	96 (0.43)	500 (152.4)
BKW094 (1)	3/32" (2.36)	184 (0.82)	500 (152.4)
BKW125 (1)	1/8" (3.17)	340 (1.51)	500 (152.4)
BKW188 (2)	3/16" (4.77)	840 (3.73)	250 (76.2)

(1) Wire Rope Construction Type 7 x 7

(2) Wire Rope Construction Type 7 x 19



KwikWire™ Cutter

- Used to cut wire rope.
- Never use cutter on energized circuits, wire, or cable.
- Box Quantity - 1

Part Number	Wt. Per 100 Lbs. (kg)
BKCC	1.0 (0.45)



Read safety/installation instruction sheets in packages before use.

Spring Steel Fasteners

KwikPak™

- Includes a supply of kwik-clamps and a spool of wire rope.

Part Number	Kit Includes	Box Qty.
BKP10063	BKC100 (100 pcs.) 1/16" Diameter Wire Rope (500 ft.)	1
BKP10094	BKC100 (100 pcs.) 3/32" Diameter Wire Rope (500 ft.)	1
BKP20125	BKC200 (50 pcs.) 1/8" Diameter Wire Rope (500 ft.)	1
BKP20188	BKC200 (50 pcs.) 3/16" Diameter Wire Rope (250 ft.)	1



(1) Pass the wire rope through the KwikWire™ Clamp



(2) Loop wire rope through/around support



(3) Pass wire rope back through KwikWire Clamp



(4) Push wire rope through clamp leaving 2" to 3" tail, then apply tension on wire rope



(5) To adjust, remove tension and pull wire rope slightly to disengage teeth, slide adjustment pin in direction shown by arrow to release wire rope.

Read safety/installation instruction sheets in packages before use.


KwikWire™ Hanger

- KwikWire hanger combines the versatility of a bolt with an adjustable wire rope solution.
- Can be quickly installed in existing anchors or metal brackets with a nut.
- ARS, ARC, and ARW anchors are ideal for use with KwikWire Hangers.
- Ideal for supporting light fixtures, wire basket cable tray, HVAC ducts, and sign/banner supports.
- Allows for tool-less adjustment of wire rope.

Part Number	Thread Size	For Use With Wire Rope Diameters	Loading SF5	
			lbs.	(kg)
BKF100-4	1/4"-20	1/16"	45	(20.0)
		3/32"	90	(40.0)
BKF100-6	3/8"-16	1/8"	45	(20.0)
		3/16"	90	(40.0)




KwikWire Hanger installation

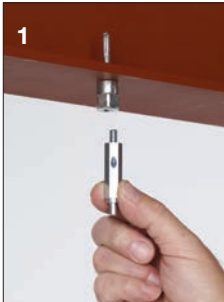


1. Screw KwikWire Hanger into installed hanger support (ARS anchor pictured)



2. Push cable wire up through the bottom of KwikWire Hanger

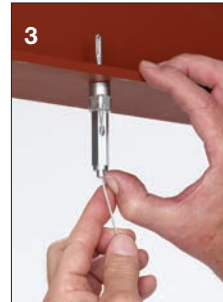


3. Continue pushing through until 1/4" minimum is extending out the side of the KwikWire Hanger

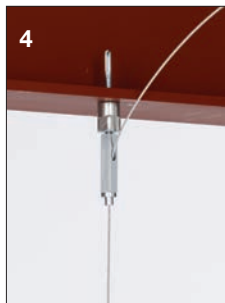

4. To adjust up - pull or push more cable wire through KwikWire Hanger



5. When hanging the cable wire is complete, cut off any excess cable wire if desired

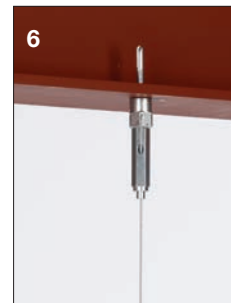

6. When hanging the cable wire is complete, cut off any excess cable wire if desired

Read safety/installation instruction sheets in packages before use.

KwikWire™ Accessory Features

- Reduces on the job installation time
- Can be installed quickly without drilling into existing structure
- Increases versatility in the field
- KwikWire accessory system reduces inventory and shipping costs
- No more sawing, filing, or fixing nuts
- Designed for use with cable tray, lighting, and HVAC
- Eliminates the need for all threaded rod
- Cost effective solution for jack chain
- “Y” style accessories require 50% less drilling



KwikWire Accessory Numbering System

Product Line	Assembly Configuration	Leg Termination	Leg Length	Wire Rope Diameter	Straight Length	Assembly or Kit
BK = KwikWire	Blank = Single Leg Y = 2 Legs 3 - 3 Legs	A = Angle Bracket w/Pin H = Hook L = Loop T = Toggle W = Fuse Cut B25 = Bolt w/ 1/4"-20 Thread B38 = Bolt w/ 3/8"-16 Thread BM6 = Bolt w/ M6 Thread BM8 = Bolt w/ M8 Thread BM10 = Bolt w/ M10 Thread	Blank = See Straight Length 18 = 18" Leg 30 = 30" Leg	063 = 1/16" 094 = 3/32"	Blank = Loop w/ Plastic Tube 18 = 18" 30 = 30" 40 = 40" 80 = 80" 120 = 120" 180 = 180" 240 = 240" 360 = 360"	Blank = Assembly Only K = Kit (Assembly & BKC100 Clamp)

Examples

BKYT18-094-120K

BK **Y** **T** **18** - **094** - **120** **K**

Cooper B-Line KwikWire Accessory

2 legs - toggle leg termination - 18" legs - 3/32" diameter wire - 120" straight length - kit with clamp

BKL-063-120K

BK **L** - **063** - **120** **K**

Cooper B-Line KwikWire Accessory

single leg - looped leg termination - 1/16" diameter wire - 120" straight length - kit with clamp

Custom assemblies are available as shown by the red dot ● on pages 259 - 266.
Lead time on custom assemblies is 2 to 3 weeks depending on quantities.

Read safety/installation instruction sheets in packages before use.

KwikWire™ Loop Termination



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKL-063-40	1/16"	(1.59)	40"	(1016)
●	BKL-063-80	1/16"	(1.59)	80"	(2032)
●	BKL-063-120	1/16"	(1.59)	120"	(3948)
●	BKL-063-180	1/16"	(1.59)	180"	(4572)
●	BKL-063-240	1/16"	(1.59)	240"	(6096)
●	BKL-063-360	1/16"	(1.59)	360"	(9144)
●	BKL-094-40	3/32"	(2.36)	40"	(1016)
●	BKL-094-80	3/32"	(2.36)	80"	(2032)
●	BKL-094-120	3/32"	(2.36)	120"	(3948)
●	BKL-094-180	3/32"	(2.36)	180"	(4572)
●	BKL-094-240	3/32"	(2.36)	240"	(6096)
●	BKL-094-360	3/32"	(2.36)	360"	(9144)

KwikWire™ Loop Termination Kits



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKL-063-40K	1/16"	(1.59)	40"	(1016)
●	BKL-063-80K	1/16"	(1.59)	80"	(2032)
●	BKL-063-120K	1/16"	(1.59)	120"	(3948)
●	BKL-063-180K	1/16"	(1.59)	180"	(4572)
●	BKL-063-240K	1/16"	(1.59)	240"	(6096)
●	BKL-063-360K	1/16"	(1.59)	360"	(9144)
●	BKL-094-40K	3/32"	(2.36)	40"	(1016)
●	BKL-094-80K	3/32"	(2.36)	80"	(2032)
●	BKL-094-120K	3/32"	(2.36)	120"	(3948)
●	BKL-094-180K	3/32"	(2.36)	180"	(4572)
●	BKL-094-240K	3/32"	(2.36)	240"	(6096)
●	BKL-094-360K	3/32"	(2.36)	360"	(9144)

- Available as a wire rope with loop termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

Spring Steel Fasteners

SPRING STEEL
FASTENERS

KwikWire™ Single Style Hook Termination



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKH-094-40	3/32"	(2.36)	40"	(1016)
●	BKH-094-80	3/32"	(2.36)	80"	(2032)
●	BKH-094-120	3/32"	(2.36)	120"	(3948)
●	BKH-094-180	3/32"	(2.36)	180"	(4572)
●	BKH-094-240	3/32"	(2.36)	240"	(6096)
●	BKH-094-360	3/32"	(2.36)	360"	(9144)

KwikWire™ Single Style Hook Termination Kits




Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKH-094-40K	3/32"	(2.36)	40"	(1016)
●	BKH-094-80K	3/32"	(2.36)	80"	(2032)
●	BKH-094-120K	3/32"	(2.36)	120"	(3948)
●	BKH-094-180K	3/32"	(2.36)	180"	(4572)
●	BKH-094-240K	3/32"	(2.36)	240"	(6096)
●	BKH-094-360K	3/32"	(2.36)	360"	(9144)

KwikWire™ 'Y' Style Hook Termination With Loop

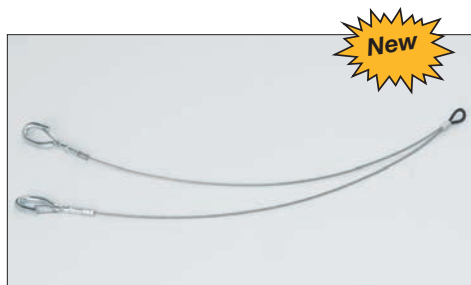


Box Quantity - 10

5 bags containing 2 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKYH18-094	3/32"	(2.36)	18"	(457)
●	BKYH30-094	3/32"	(2.36)	30"	(762)

- Hook designed to accept up to 3/8" diameter wire.
- Available as a wire rope with hook termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".
- Available in single, double (Y), and triple (3) leg styles

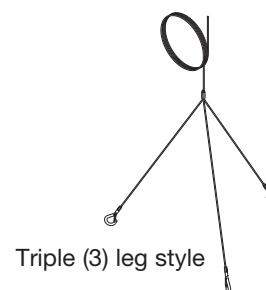

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

KwikWire™ 'Y' Style Hook Termination



Box Quantity - 10

5 bags containing 2 pieces per bag

Part Number	Leg Length in. (mm)	Wire Rope Diameter in. (mm)	Length
● BKYH18-094-40	18" (457)	3/32" (2.36)	40" (1016)
● BKYH18-094-80	18" (457)	3/32" (2.36)	80" (2032)
● BKYH18-094-120	18" (457)	3/32" (2.36)	120" (3948)
● BKYH18-094-180	18" (457)	3/32" (2.36)	180" (4572)
● BKYH18-094-240	18" (457)	3/32" (2.36)	240" (6096)
● BKYH18-094-360	18" (457)	3/32" (2.36)	360" (9144)
● BKYH30-094-40	30" (762)	3/32" (2.36)	40" (1016)
● BKYH30-094-80	30" (762)	3/32" (2.36)	80" (2032)
● BKYH30-094-120	30" (762)	3/32" (2.36)	120" (3948)
● BKYH30-094-180	30" (762)	3/32" (2.36)	180" (4572)
● BKYH30-094-240	30" (762)	3/32" (2.36)	240" (6096)
● BKYH30-094-360	30" (762)	3/32" (2.36)	360" (9144)

KwikWire™ 'Y' Style Hook Termination Kits



Box Quantity - 10

5 bags containing 2 pieces per bag

Part Number	Leg Length in. (mm)	Wire Rope Diameter in. (mm)	Length
● BKYH18-094-40K	18" (457)	3/32" (2.36)	40" (1016)
● BKYH18-094-80K	18" (457)	3/32" (2.36)	80" (2032)
● BKYH18-094-120K	18" (457)	3/32" (2.36)	120" (3948)
● BKYH18-094-180K	18" (457)	3/32" (2.36)	180" (4572)
● BKYH18-094-240K	18" (457)	3/32" (2.36)	240" (6096)
● BKYH18-094-360K	18" (457)	3/32" (2.36)	360" (9144)
● BKYH30-094-40K	30" (762)	3/32" (2.36)	40" (1016)
● BKYH30-094-80K	30" (762)	3/32" (2.36)	80" (2032)
● BKYH30-094-120K	30" (762)	3/32" (2.36)	120" (3948)
● BKYH30-094-180K	30" (762)	3/32" (2.36)	180" (4572)
● BKYH30-094-240K	30" (762)	3/32" (2.36)	240" (6096)
● BKYH30-094-360K	30" (762)	3/32" (2.36)	360" (9144)

- Hook designed to accept up to 3/8" diameter wire.
- Available as a wire rope with loop termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

Spring Steel Fasteners

KwikWire™ Single Style Toggle Termination



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKT-063-40	1/16"	(1.59)	40"	(1016)
●	BKT-063-80	1/16"	(1.59)	80"	(2032)
●	BKT-063-120	1/16"	(1.59)	120"	(3948)
●	BKT-063-180	1/16"	(1.59)	180"	(4572)
●	BKT-063-240	1/16"	(1.59)	240"	(6096)
●	BKT-063-360	1/16"	(1.59)	360"	(9144)

KwikWire™ Single Style Toggle Termination Kits




Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKT-063-40K	1/16"	(1.59)	40"	(1016)
●	BKT-063-80K	1/16"	(1.59)	80"	(2032)
●	BKT-063-120K	1/16"	(1.59)	120"	(3948)
●	BKT-063-180K	1/16"	(1.59)	180"	(4572)
●	BKT-063-240K	1/16"	(1.59)	240"	(6096)
●	BKT-063-360K	1/16"	(1.59)	360"	(9144)

KwikWire™ 'Y' Style Toggle Termination With Loop

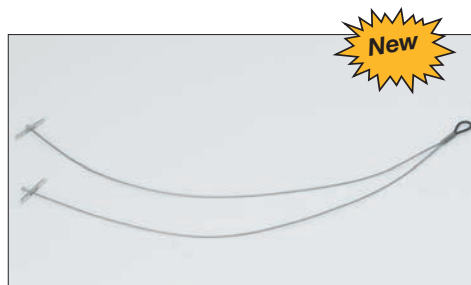


Box Quantity - 10

5 bags containing 2 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKYT12-063	1/16"	(1.59)	12"	(305)
●	BKYT18-063	1/16"	(1.59)	18"	(457)
●	BKYT30-063	1/16"	(1.59)	30"	(762)

- Available as a wire rope with toggle termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".
- Available in single, double (Y), and triple (3) leg styles
- All triple (3) leg styles are non-stock, consult Cooper B-Line for lead times

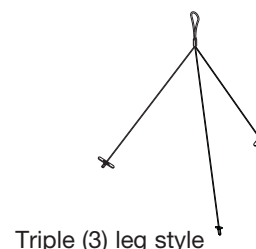

Triple (3) leg style

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

KwikWire™ 'Y' Style Toggle Termination



Box Quantity - 10
5 bags containing 2 pieces per bag

Part Number	Leg Length		Wire Rope Diameter		Length	
	in.	(mm)	in.	(mm)		
● BKYT12-063-40	12"	(305)	1/16"	(1.59)	40"	(1016)
● BKYT12-063-80	12"	(305)	1/16"	(1.59)	80"	(2032)
● BKYT12-063-120	12"	(305)	1/16"	(1.59)	120"	(3948)
● BKYT12-063-180	12"	(305)	1/16"	(1.59)	180"	(4572)
● BKYT12-063-240	12"	(305)	1/16"	(1.59)	240"	(6096)
● BKYT12-063-360	12"	(305)	1/16"	(1.59)	360"	(9144)
● BKYT18-063-40	18"	(457)	1/16"	(1.59)	40"	(1016)
● BKYT18-063-80	18"	(457)	1/16"	(1.59)	80"	(2032)
● BKYT18-063-120	18"	(457)	1/16"	(1.59)	120"	(3948)
● BKYT18-063-180	18"	(457)	1/16"	(1.59)	180"	(4572)
● BKYT18-063-240	18"	(457)	1/16"	(1.59)	240"	(6096)
● BKYT18-063-360	18"	(457)	1/16"	(1.59)	360"	(9144)
● BKYT30-063-40	18"	(457)	1/16"	(1.59)	40"	(1016)
● BKYT30-063-80	30"	(762)	1/16"	(1.59)	80"	(2032)
● BKYT30-063-120	30"	(762)	1/16"	(1.59)	120"	(3948)
● BKYT30-063-180	30"	(762)	1/16"	(1.59)	180"	(4572)
● BKYT30-063-240	30"	(762)	1/16"	(1.59)	240"	(6096)
● BKYT30-063-360	30"	(762)	1/16"	(1.59)	360"	(9144)

KwikWire™ 'Y' Style Toggle Termination Kits



Box Quantity - 10
5 bags containing 2 pieces per bag

Part Number	Leg Length		Wire Rope Diameter		Length	
	in.	(mm)	in.	(mm)		
● BKYT12-063-40K	12"	(305)	1/16"	(1.59)	40"	(1016)
● BKYT12-063-80K	12"	(305)	1/16"	(1.59)	80"	(2032)
● BKYT12-063-120K	12"	(305)	1/16"	(1.59)	120"	(3948)
● BKYT12-063-180K	12"	(305)	1/16"	(1.59)	180"	(4572)
● BKYT12-063-240K	12"	(305)	1/16"	(1.59)	240"	(6096)
● BKYT12-063-360K	12"	(305)	1/16"	(1.59)	360"	(9144)
● BKYT18-063-40K	18"	(457)	1/16"	(1.59)	40"	(1016)
● BKYT18-063-80K	18"	(457)	1/16"	(1.59)	80"	(2032)
● BKYT18-063-120K	18"	(457)	1/16"	(1.59)	120"	(3948)
● BKYT18-063-180K	18"	(457)	1/16"	(1.59)	180"	(4572)
● BKYT18-063-240K	18"	(457)	1/16"	(1.59)	240"	(6096)
● BKYT18-063-360K	18"	(457)	1/16"	(1.59)	360"	(9144)
● BKYT30-063-40K	18"	(457)	1/16"	(1.59)	40"	(1016)
● BKYT30-063-80K	30"	(762)	1/16"	(1.59)	80"	(2032)
● BKYT30-063-120K	30"	(762)	1/16"	(1.59)	120"	(3948)
● BKYT30-063-180K	30"	(762)	1/16"	(1.59)	180"	(4572)
● BKYT30-063-240K	30"	(762)	1/16"	(1.59)	240"	(6096)
● BKYT30-063-360K	30"	(762)	1/16"	(1.59)	360"	(9144)

- Available as a wire rope with loop termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".

● = Stock item, lead time 2 - 3 working days ● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

Spring Steel Fasteners

KwikWire™ Bolt Termination

SPRING STEEL
FASTENERS




Box Quantity - 20

5 bags containing 4 pieces per bag

Part Number	Thread Size	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
● BKB25-063-40	1/4"-20	1/16"	(1.59)	40"	(1016)
● BKB25-063-80	1/4"-20	1/16"	(1.59)	80"	(2032)
● BKB25-063-120	1/4"-20	1/16"	(1.59)	120"	(3948)
● BKB25-063-180	1/4"-20	1/16"	(1.59)	180"	(4572)
● BKB25-063-240	1/4"-20	1/16"	(1.59)	240"	(6096)
● BKB25-063-360	1/4"-20	1/16"	(1.59)	360"	(9144)
● BKB38-094-40	3/8"-16	3/32"	(2.36)	40"	(1016)
● BKB38-094-80	3/8"-16	3/32"	(2.36)	80"	(2032)
● BKB38-094-120	3/8"-16	3/32"	(2.36)	120"	(3948)
● BKB38-094-180	3/8"-16	3/32"	(2.36)	180"	(4572)
● BKB38-094-240	3/8"-16	3/32"	(2.36)	240"	(6096)
● BKB38-094-360	3/8"-16	3/32"	(2.36)	360"	(9144)

- Ideal for use with ARS, ARC, ADI, ACPW, or ACPD anchors.
- Available as a wire rope with bolt termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".
- Available in single, double (Y), and triple leg (3) styles
- All (Y) and triple (3) styles are non-stock, consult Cooper B-Line for lead times

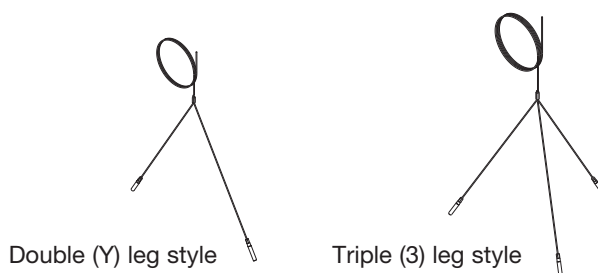

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

KwikWire™ Bolt Termination Kits



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Thread Size	Wire Rope Diameter		Length	
			in.	(mm)	in.	(mm)
●	BKB25-063-40K	1/4"-20	1/16"	(1.59)	40"	(1016)
●	BKB25-063-80K	1/4"-20	1/16"	(1.59)	80"	(2032)
●	BKB25-063-120K	1/4"-20	1/16"	(1.59)	120"	(3948)
●	BKB25-063-180K	1/4"-20	1/16"	(1.59)	180"	(4572)
●	BKB25-063-240K	1/4"-20	1/16"	(1.59)	240"	(6096)
●	BKB25-063-360K	1/4"-20	1/16"	(1.59)	360"	(9144)
●	BKB38-094-40K	3/8"-16	3/32"	(2.36)	40"	(1016)
●	BKB38-094-80K	3/8"-16	3/32"	(2.36)	80"	(2032)
●	BKB38-094-120K	3/8"-16	3/32"	(2.36)	120"	(3948)
●	BKB38-094-180K	3/8"-16	3/32"	(2.36)	180"	(4572)
●	BKB38-094-240K	3/8"-16	3/32"	(2.36)	240"	(6096)
●	BKB38-094-360K	3/8"-16	3/32"	(2.36)	360"	(9144)

- Ideal for use with ARS, ARC, ADI, ACPW, or ACPD anchors.
- Available as a wire rope with bolt termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".
- Available in single, double (Y), and triple (3) styles
- All double (Y) and triple (3) styles are non-stock, consult Cooper B-Line for lead times



Double (Y) leg style



Triple (3) leg style

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.

KwikWire™ Angle Bracket Termination



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKA-063-40	1/16"	(1.59)	40"	(1016)
●	BKA-063-80	1/16"	(1.59)	80"	(2032)
●	BKA-063-120	1/16"	(1.59)	120"	(3948)
●	BKA-063-180	1/16"	(1.59)	180"	(4572)
●	BKA-063-240	1/16"	(1.59)	240"	(6096)
●	BKA-063-360	1/16"	(1.59)	360"	(9144)

KwikWire™ Angle Bracket Termination Kits



Box Quantity - 20

5 bags containing 4 pieces per bag

	Part Number	Wire Rope Diameter		Length	
		in.	(mm)	in.	(mm)
●	BKA-063-40K	1/16"	(1.59)	40"	(1016)
●	BKA-063-80K	1/16"	(1.59)	80"	(2032)
●	BKA-063-120K	1/16"	(1.59)	120"	(3948)
●	BKA-063-180K	1/16"	(1.59)	180"	(4572)
●	BKA-063-240K	1/16"	(1.59)	240"	(6096)
●	BKA-063-360K	1/16"	(1.59)	360"	(9144)

- Available as a wire rope with angle bracket termination only or as a ready-to-use kit with a BKC100 clamp.
- Available in lengths of 40", 80", 120", 180", 240", and 360".

● = Stock item, lead time 2 - 3 working days

● = Non-stock item, lead time 10 - 15 working days

Read safety/installation instruction sheets in packages before use.