




Catalog  
C18

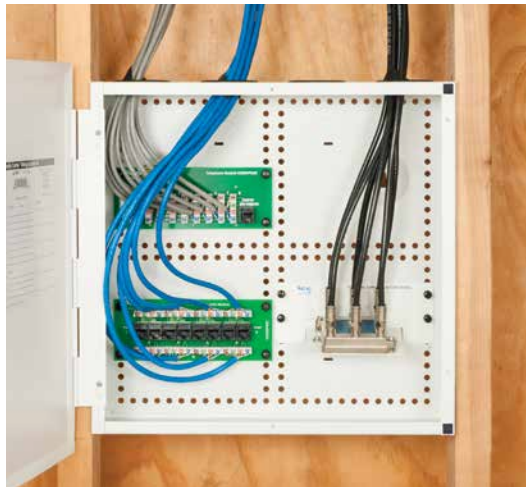

ICC tailors its solutions to small and medium-sized installers to help them win more projects.

## Small & Mid-sized Installers



## High Profit Margin

ICC prices are low, up to 60% lower compared to the big brands; so our Elite Installers can increase their margin and win more projects.

ICC focuses only on non-spec projects. We help our Elite Installers win those projects over the expensive spec brands.

## Non-Spec Projects






## Value Distribution Network

ICC distributors share the same value as ICC, we work together to keep our prices low.

ICC offers end-to-end structured cabling solutions with nine product categories as a single vendor solution, so our Elite Installers have no compatibility issues from mixing vendors.

## One Vendor


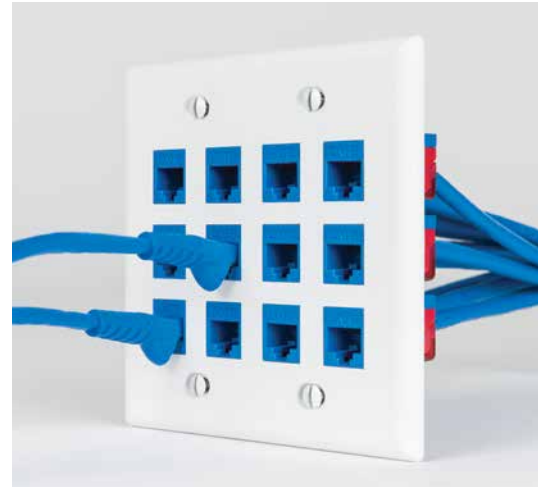


## Ease of Installation

ICC engineers its products to keep installation simple, minimizing training time and reducing labor cost.



# Join the Elite

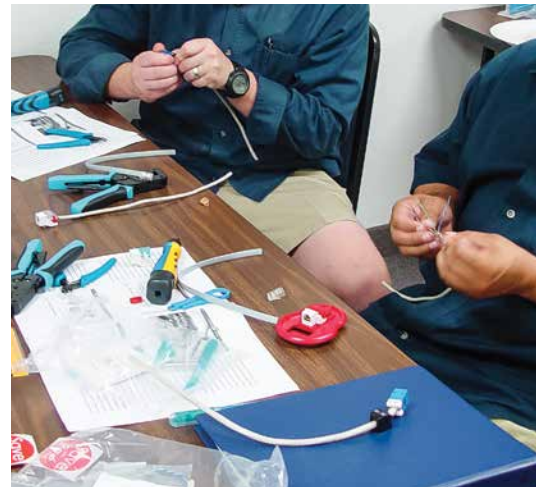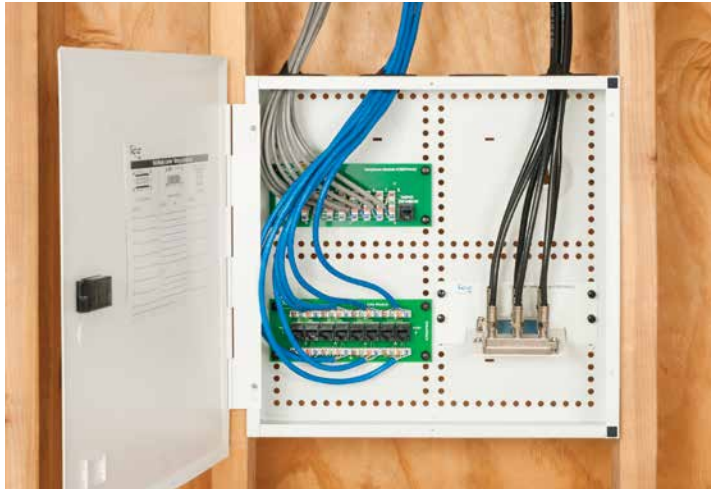



## Elite Installer™



- Free membership
- 15-Year Performance Limited Warranty
- Project discounts
- Sales promotions
- Free product samples and demos
- New product releases
- Reward points

## Certified Elite Installer™



- Paid membership
- All benefits from Elite, plus:
- Lifetime Performance Limited Warranty
- One free Master Technician Training Course included
- Free unlimited site verifications
- Free tools

## Master Technician Training

- One-day course
- Earn a Master Technician License
- BICSI® certified
- Earn BICSI Continuing Education Credits
- Hands-on training

Visit [icc.com/elite](https://icc.com/elite) to sign up and learn more about the Elite Installer program.


# Table of Contents

|    |                                |
|----|--------------------------------|
| 01 | Work Area Outlets              |
| 25 | Patch Panels and Cross-connect |
| 35 | Premise Cables                 |
| 39 | Fiber Optic System             |
| 49 | Racks and Cable Management     |
| 69 | Residential Enclosures         |
| 77 | Cords and Cable Assemblies     |
| 81 | Raceway and Wiring Ducts       |
| 85 | Tools and Accessories          |
| 90 | Part Number Index              |



This catalog is an overview of our wide product selection. Visit us online at [icc.com](http://icc.com) for our full line of products, detailed information, tech specs, and installation instructions.

© 2018, ICC. ICC and the ICC logo are a registered trade name and trademark. All rights reserved. The materials contained here are protected by copyright, trademark, and other intellectual property laws and may not be copied, modified, or used in any unauthorized manner without the express, written permission from ICC. All other trade names and trademarks are the property of their respective owners.

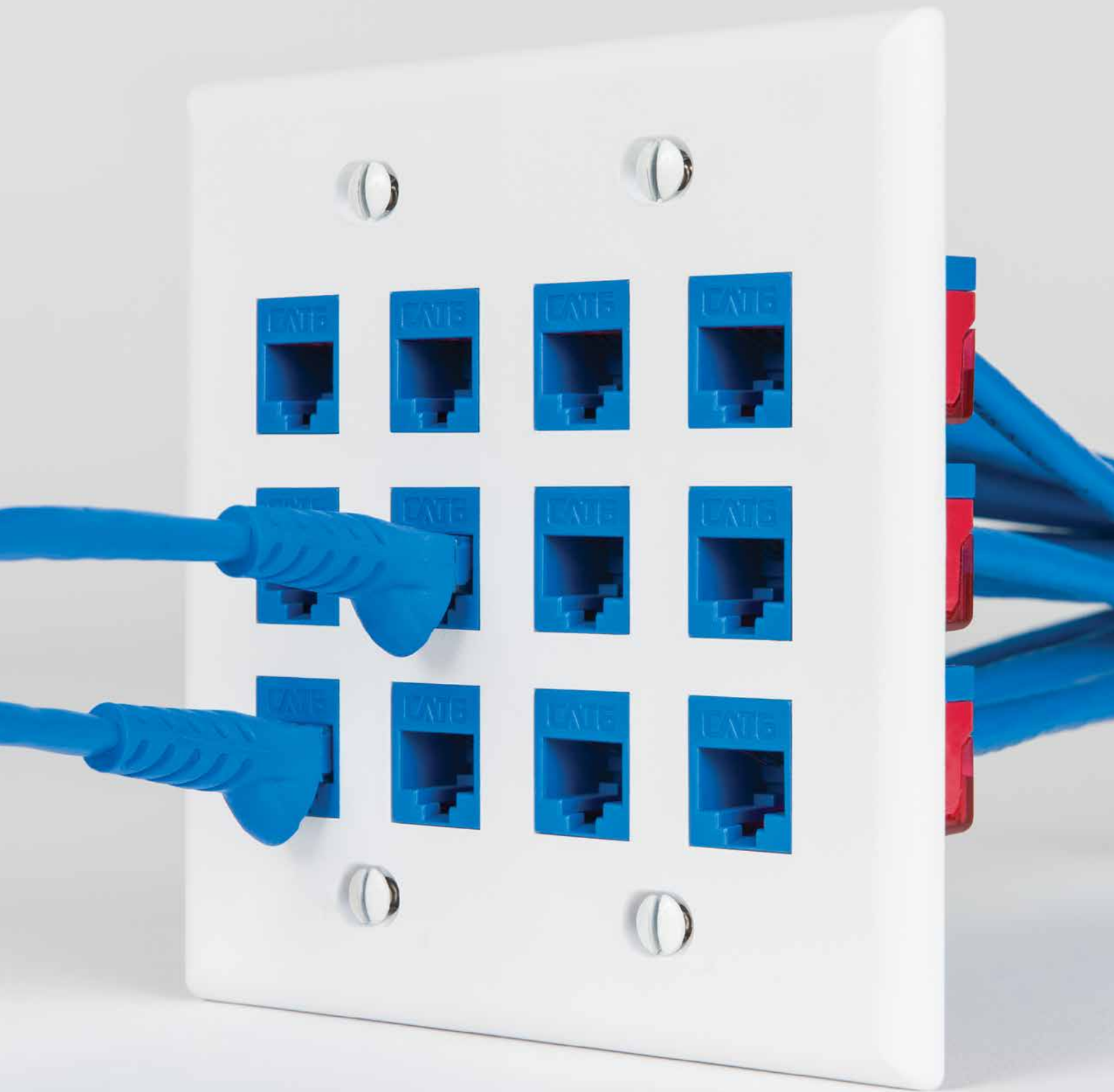

# Work Area Outlets







## High Density (HD) Keystone Jacks



Colored wiring diagram

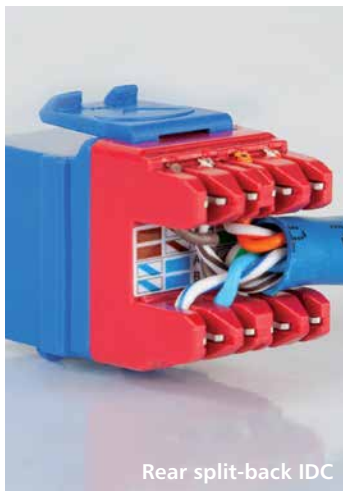

Rear split-back IDC

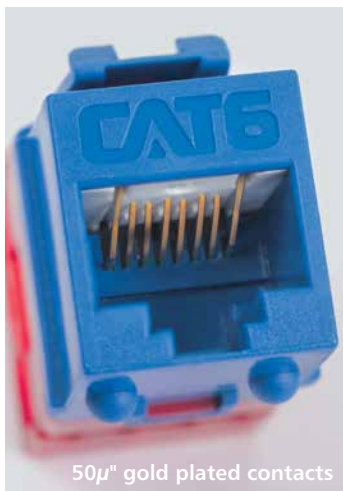

50µm gold plated contacts



Terminate and trim wires in one squeeze



### 25-Pack ValuePacks

- Packaged in a resealable bag
- Reduces packaging waste
- Lowers the cost per unit

|        |                         |
|--------|-------------------------|
| CAT 6  | IC107F6Cxx <sup>2</sup> |
| CAT 5e | IC107F5Cxx <sup>2</sup> |
| 6P6C   | IC1076FCxx <sup>3</sup> |

<sup>2</sup>Available in: WH, IV, BL, OR, RD, BK

<sup>3</sup>Available in: WH, IV



### 400-Pack ValuePacks

- Packaged in a resealable box
- Ten jacks per bag, forty bags per box
- Lowers the cost per unit

|        |                         |
|--------|-------------------------|
| CAT 6  | IC107F6Vxx <sup>4</sup> |
| CAT 5e | IC107F5Vxx <sup>4</sup> |
| 6P6C   | IC1076FVWH              |

<sup>4</sup>Available in: WH, BL

### HD Keystone Jacks

- Exceeds TIA-568 performance


|            |                         |
|------------|-------------------------|
| CAT 6A FTP | IC1078S6A0              |
| CAT 6A UTP | IC1078GAxx <sup>2</sup> |
| CAT 6      | IC1078F6xx <sup>1</sup> |
| CAT 5e     | IC1078F5xx <sup>1</sup> |
| 6P6C       | IC1076F0xx <sup>1</sup> |

<sup>1</sup>Color Options:  
See more at icc.com







Six HD jacks in a Decorex™ insert

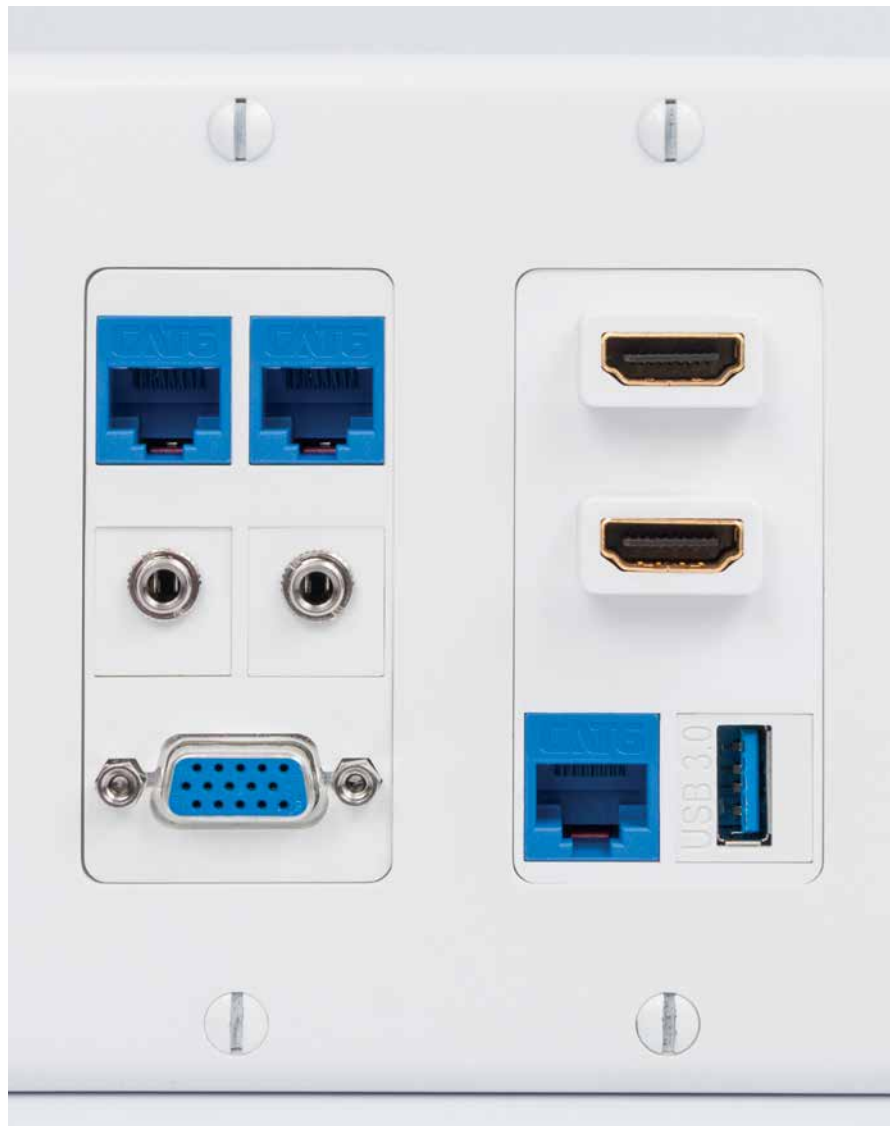

## HD in the Work Area

With a narrow body, up to six HD keystone jacks can be installed in a Decorex™ insert to maximize usage of space. Installing CAT 6A keystone jacks require standard spacing between ports to reduce alien crosstalk.



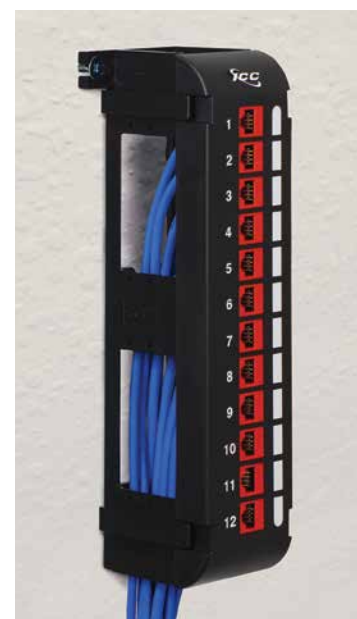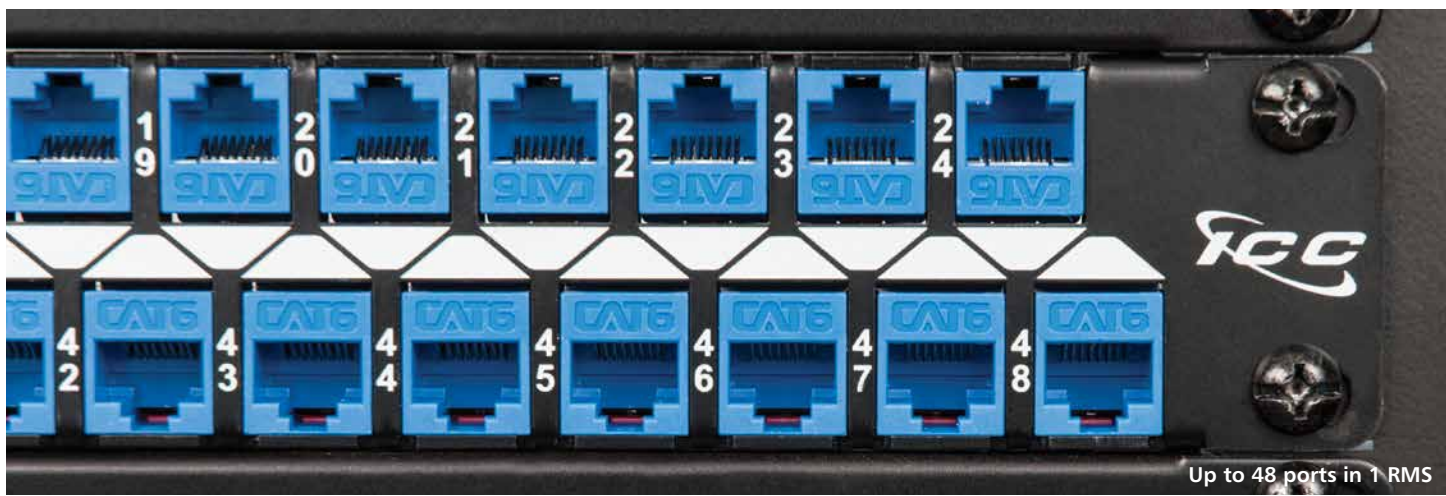

## HD in the Telecom Closet

HD keystone jacks can help maximize connectivity in the telecom closet by providing up to 48 ports of connectivity within one rack mount space.



## Easy (EZ®) Keystone Jacks





Colored wiring diagram



In-line 110 IDC



Cap terminated wires



Terminate and trim wires in one squeeze



Free JackEasy™ included

### EZ Keystone Jacks

- Unshielded Twisted Pair (UTP)
- Exceeds TIA-568 performance

CAT 6  
CAT 5e  
6P6C

IC1078L6xx<sup>1</sup>  
IC1078E5xx<sup>1</sup>  
IC1076V0xx<sup>1</sup>

### 25-Pack ValuePacks

- Packaged in a resealable bag
- Reduces packaging waste
- Lowers the cost per unit

CAT 6  
CAT 5e  
6P6C

IC107L6Cxx<sup>2</sup>  
IC107E5Cxx<sup>2</sup>  
IC1076VCxx<sup>3</sup>

<sup>2</sup>Available in: WH, IV, BL, OR, RD, BK

<sup>3</sup>Available in: WH, IV

### 400-Pack ValuePacks

- Packaged in a resealable box
- Ten jacks per bag, forty bags per box
- Lowers the cost per unit


CAT 6  
CAT 5e  
6P6C

IC107L6Vxx<sup>4</sup>  
IC107E5Vxx<sup>4</sup>  
IC1076VVWH

<sup>4</sup>Available in: WH, BL

<sup>1</sup>Color Options:  
See more at [icc.com](http://icc.com)




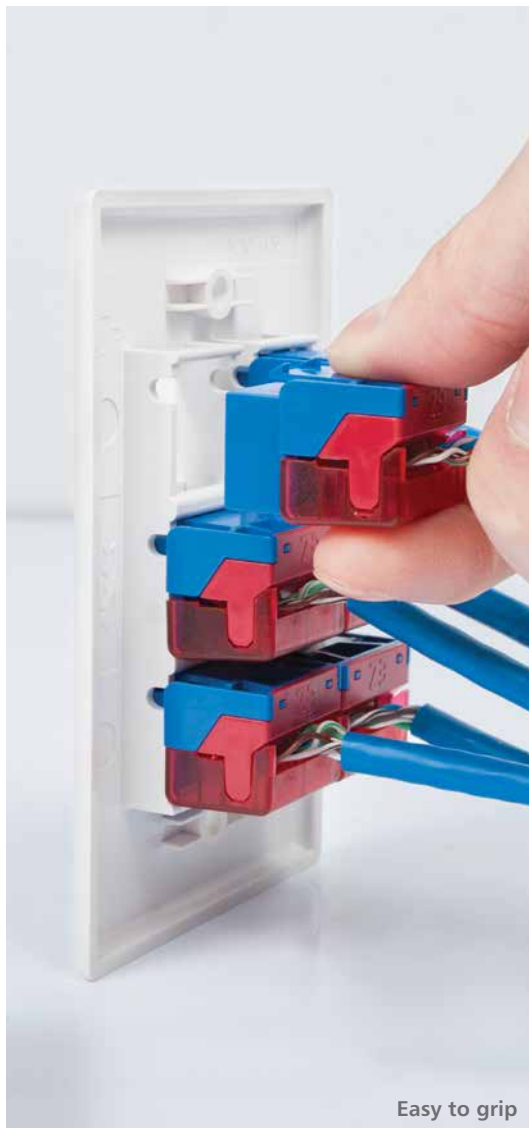


Easy to grip



Six EZs in a single gang

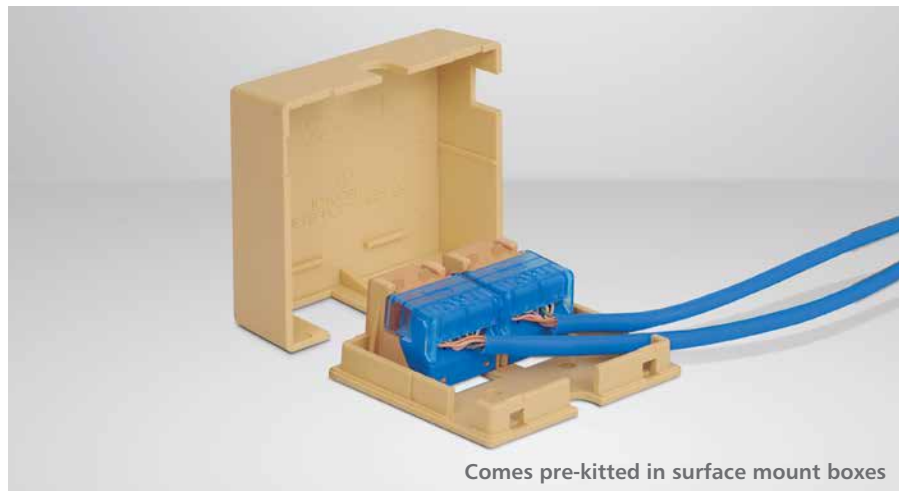

Comes pre-kitted in surface mount boxes

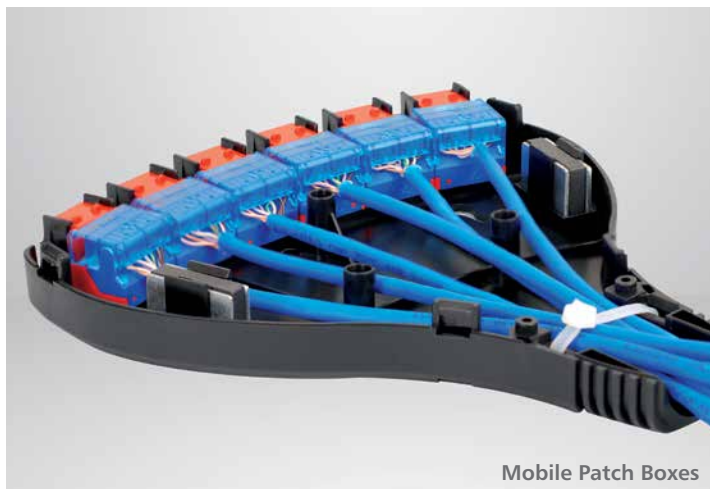

Mobile Patch Boxes




## EZ® in the Work Area

EZ keystone jacks work with a wide variety of faceplates, surface mount boxes, mounting boxes, and mobile patch boxes.





Easy to service and manage

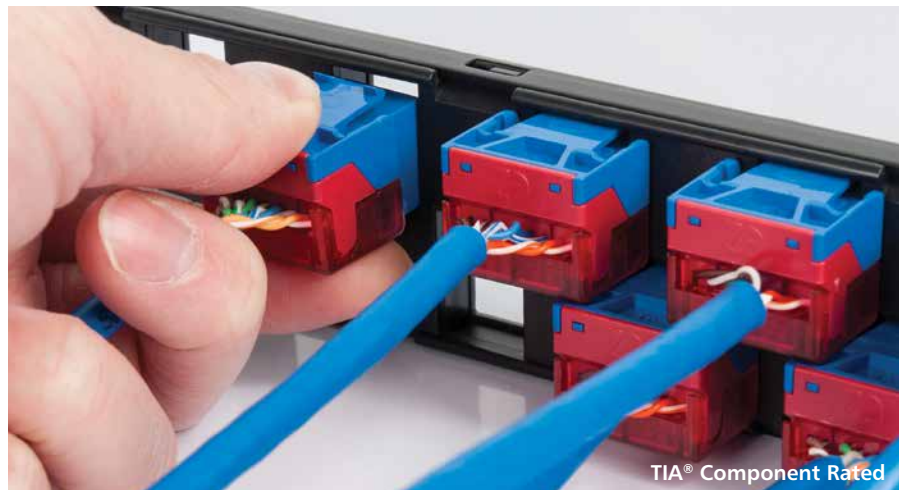


TIA® Component Rated



## EZ® in the Telecom Closet

With a wider body, EZ keystone jacks are staggered on patch panels to allow for easy insertion and removal.

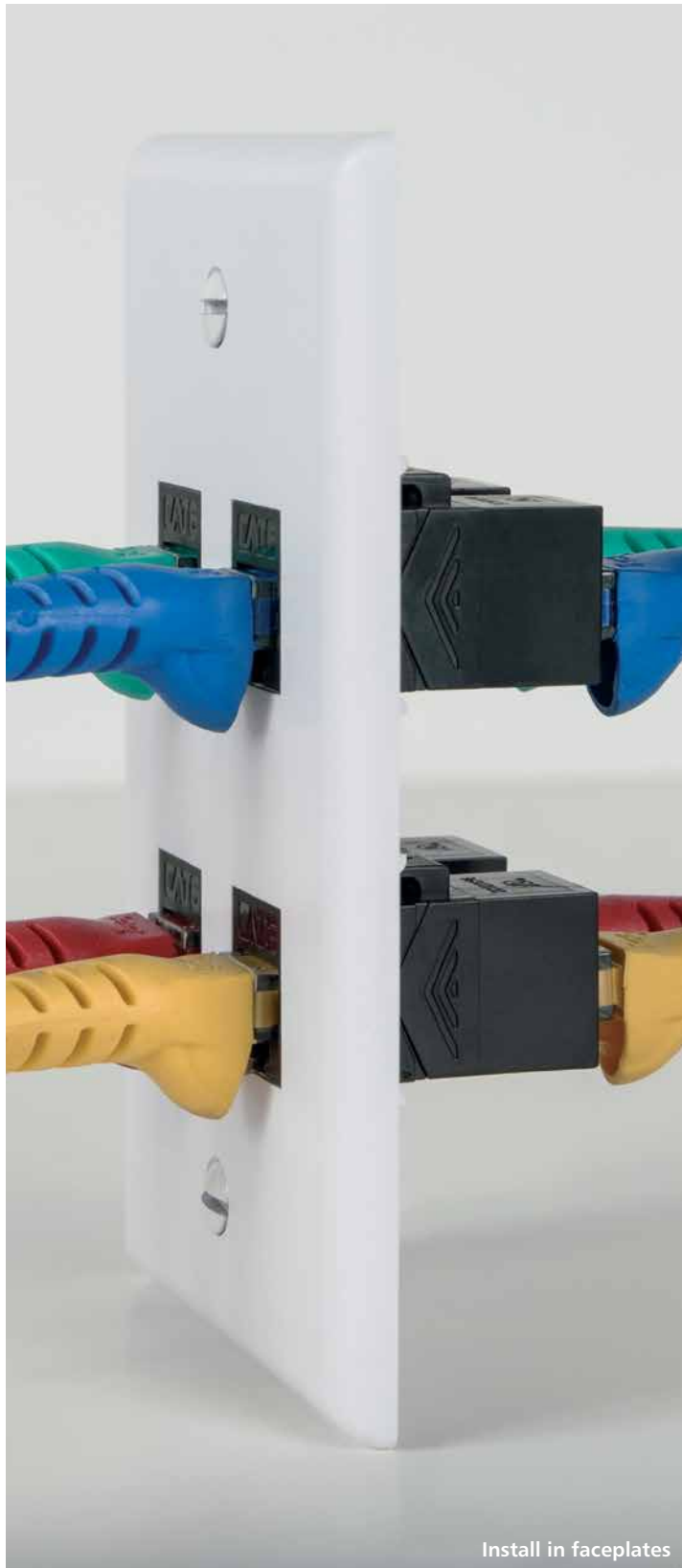

Install in faceplates



Install in blank patch panels

## Couplers & Inserts



Available in resealable bags

### Keystone Couplers

- HD style
- TIA® Component Rated
- No termination required
- 50 micro-inch gold plated contacts
- For patch cable extension

#### 25-Pack ValuePacks

|        |            |
|--------|------------|
| CAT 6  | IC107C6CBK |
| CAT 5e | IC107C5CBK |

#### Single

|              |             |
|--------------|-------------|
| CAT 6A       | IC107C6Axx* |
| CAT 6        | IC107CP6xx* |
| CAT 5e       | IC107C5Exx* |
| 6P6C Pin 1-6 | IC107C6Sxx* |
| 6P6C Pin 1-1 | IC107C6Rxx* |


\*Color Options:  
See more at [icc.com](http://icc.com)








LC 10G Duplex

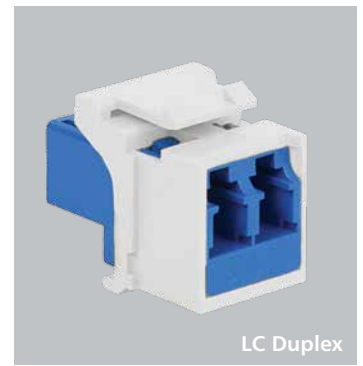

LC Duplex

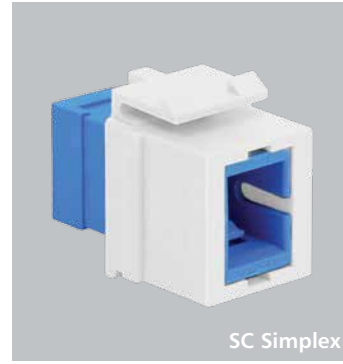

SC Simplex



ST Simplex

### Fiber Optic Couplers

- HD style
- Female/Female
- Feed-through – front and rear
- Ceramic or metal sleeves
- Supports multimode or single-mode

LC 10G Duplex  
LC Duplex  
SC Simplex  
ST Simplex

IC107LCGxx\*  
IC107LC2xx\*  
IC107SC2xx\*  
IC107ST2xx\*



### Voice Phone Couplers

- Connects line cords together
- 50 micro-inch gold plated contacts

8P8C, Pin 1-1, F to F ICMA3508DR  
6P6C, Pin 1-6, F to F ICMA350A6C  
6P6C, Pin 1-1, M to 2F ICMA267D66



### Blank Fill-In & Feed-Through Insert ValuePacks

- HD style
- Fills open and unused ports
- Pass cable through a 0.30" diameter hole

#### Fill-in

100-Pack ValuePack IC107BNVxx\*  
10-Pack ValuePack IC107BN0xx\*

#### Feed-Through

10-Pack ValuePack IC107BN2WH

\*Color Options:  
See more at [icc.com](http://icc.com)






## Audio & Video Connectors




Install in residential enclosures



100% digital A/V signals

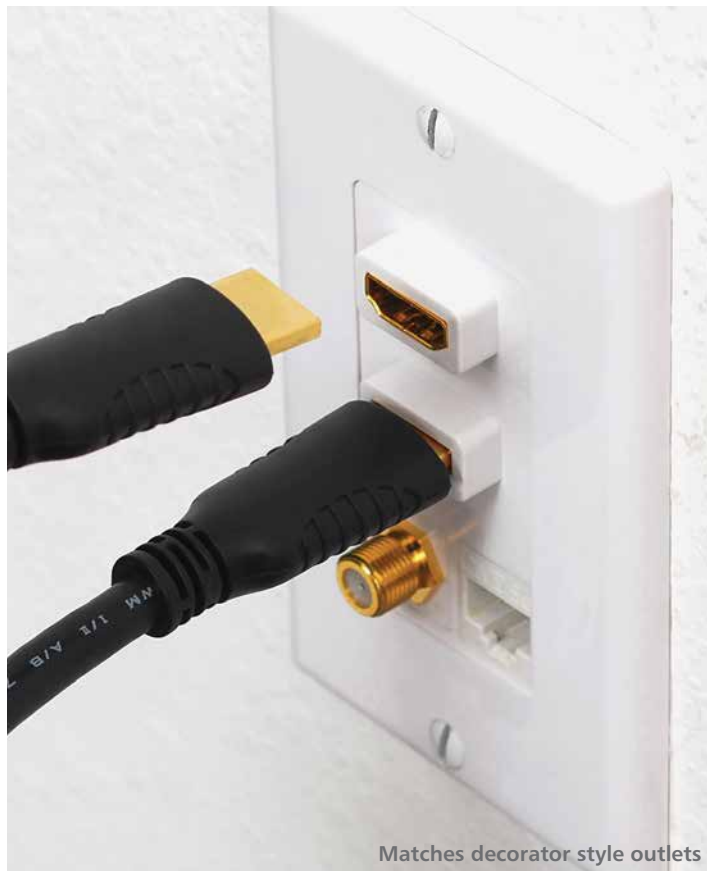

Matches decorator style outlets

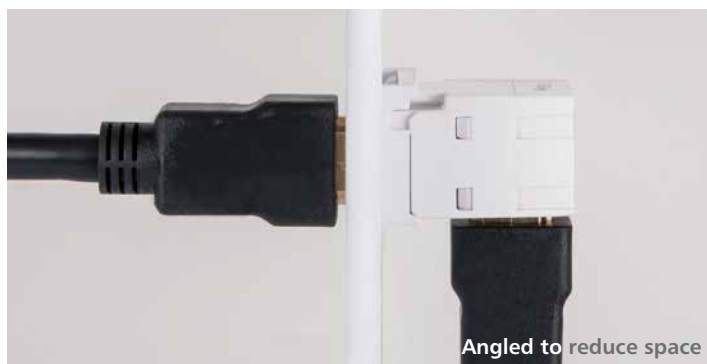

Angled to reduce space




### HDMI Couplers

- HD style
- Supports 1080p, 3D, and HDCP
- 99.99% oxygen free conductors
- 24k gold plated connectors

Female/Female  
90° Female/Female

IC107HDMxx\*  
IC107AHMWH

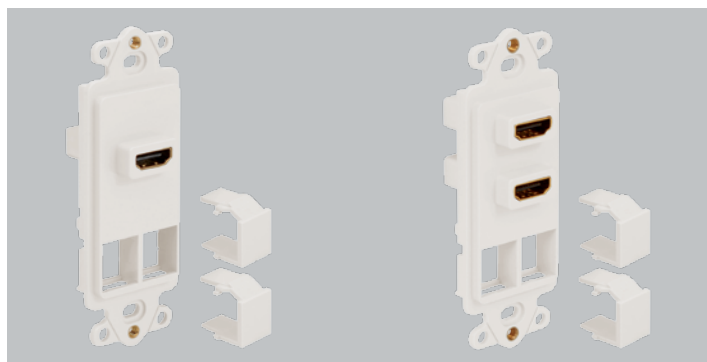

### HDMI Décorex™ Inserts

- Works with Décorex faceplates
- Includes two blank modular inserts



1 HDMI, 2 HD Ports  
2 HDMI, 2 HD Ports

IC107DH2xx\*  
IC107DDHxx\*

\*Color Options:  
See more at [icc.com](http://icc.com)





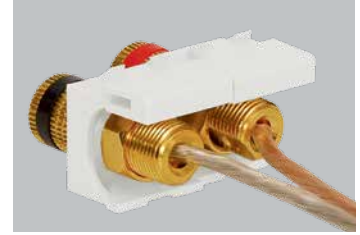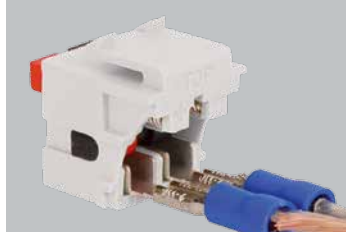

### Dual Audio Speaker Connectors

- HD style
- Patented design
- Red and black push buttons
- Molded (+) and (-) signs

Rear crimp-on  
Rear buttons

IC107DSCxx\*  
IC107DSBxx\*

### Binding Post Audio Speaker Connectors

- Gold plated posts
- Posts work with banana plugs
- Marked red and black for polarity

Pair of HD connectors IC107PMGWH



### RCA Jacks

- HD style
- Gold plated
- High quality audio and video
- 6-Pack includes: two red, one green, one blue, one white, and one blank module

**RCA/RCA**  
Red insert  
6-Pack

IC107R6GWH  
IC107RR5WH

**RCA/F-Type**  
White insert

IC107BFGWH

**RCA/IDC**  
Red insert  
White insert

IC107R8GWH  
IC107B8GWH



### 3.5mm Stereo Audio Speaker Couplers

- HD style
- Works with 3.5mm plugs

Female/Female  
Female/Push-pin

IC107SACWH  
IC107SAPxx\*



## F-Type Video Jacks


- HD style
- Female/Female
- Threaded to secure connection
- Works with RG-6 and RG-59 coaxial cable
- F-Type Compression Tool and Connectors, see page 88

|                      |             |
|----------------------|-------------|
| Nickel plated, 3 GHz | IC107B9Fxx* |
| Gold plated, 3 GHz   | IC107B9Gxx* |
| Nickel plated, 2 GHz | IC107B5Fxx* |
| Gold plated, 2 GHz   | IC107B5Gxx* |
| RG-6Q, compression   | IC107FQGW*  |

## 25-Pack ValuePacks

- Packaged in a resealable bag
- Reduces packaging waste
- Lowers the cost per unit

|                      |            |
|----------------------|------------|
| Nickel plated, 3 GHz | IC107BFDWH |
| Gold plated, 3 GHz   | IC107BGDWH |
| Nickel plated, 2 GHz | IC107BFCWH |
| Gold plated, 2 GHz   | IC107BGCWH |

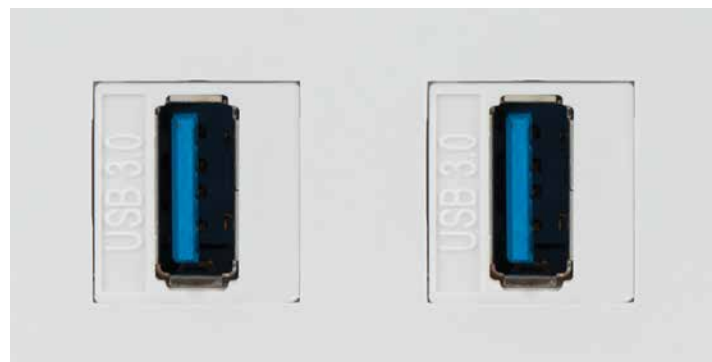

## BNC Video Jacks

- HD style
- Nickel plated
- Supports CCTV, NTSC analog video signals, and satellite link signals

|        |             |
|--------|-------------|
| 75 Ohm | IC107BNCxx* |
| 50 Ohm | IC107B3Gxx* |

## USB Couplers

- HD style
- Female/Female


|                      |            |
|----------------------|------------|
| 90°, A-to-A, USB 3.0 | IC107AUSWH |
| A-to-A, USB 3.0      | IC107UAAWH |
| A-to-B, USB 2.0      | IC107UABWH |

\*Color Options:  
See more at [icc.com](http://icc.com)





Home theater solutions

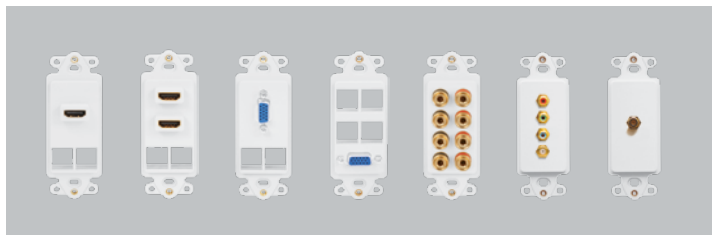

VGA: analog video


## Décorex™ Audio and Video Inserts

- Works with Décorex faceplates
- Durable ABS plastic

|                    |             |
|--------------------|-------------|
| 1 HDMI, 2 HD Ports | IC107DH2xx* |
| 2 HDMI, 2 HD Ports | IC107DDHxx* |
| 1 VGA, 2 HD Ports  | IC107DR2xx* |
| 1 VGA, 4 HD Ports  | IC107DR4xx* |
| 8 Binding Posts    | ICRDSQBPxx* |
| 3 RCA, 1 F-Type    | ICRDS3RFWH  |
| 1 F-Type           | IC630DSFxx* |



## Faceplates & Inserts

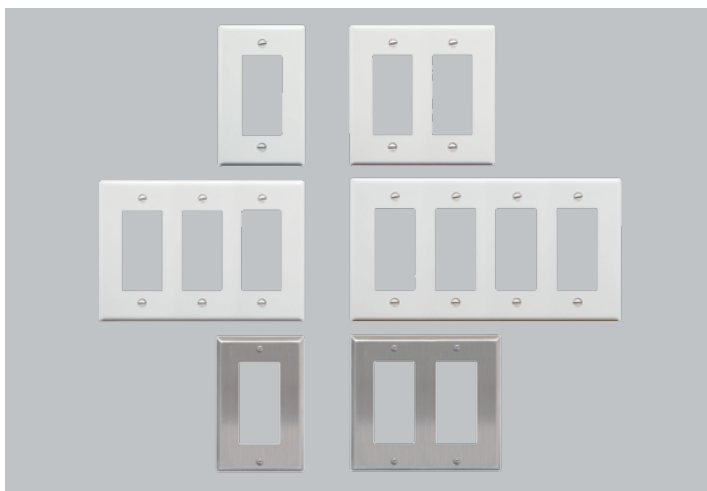


### Décorex™ Faceplates

- Decorator style outlets
- Configurable with inserts
- Smooth glossy finish
- Durable ABS plastic

- |                        |             |
|------------------------|-------------|
| 1 Insert, Single Gang  | IC107DFSxx* |
| 2 Inserts, Double Gang | IC107DFDxx* |
| 3 Inserts, Triple Gang | IC107DFTWH  |
| 4 Inserts, Quad Gang   | IC107DFQWH  |

#### Stainless Steel

- |                        |            |
|------------------------|------------|
| 1 Insert, Single Gang  | IC107DFSSS |
| 2 Inserts, Double Gang | IC107DFDSS |

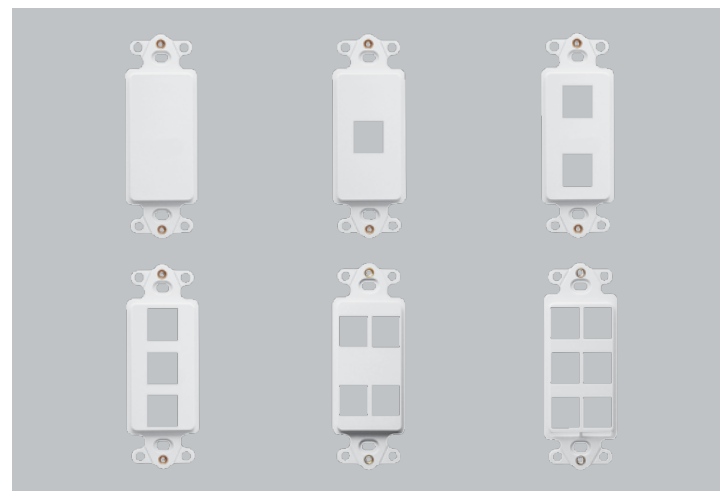

### Décorex™ Inserts

- Configurable with connectors

- |            |             |
|------------|-------------|
| Blank      | IC630DIBxx* |
| 1 Port     | IC107DI1xx* |
| 2 Ports    | IC107DI2xx* |
| 3 Ports    | IC107DI3xx* |
| 4 HD Ports | IC107DI4xx* |
| 6 HD Ports | IC107DI6xx* |


\*Color Options:  
See more at [icc.com](http://icc.com)








Accepts A/V connectors

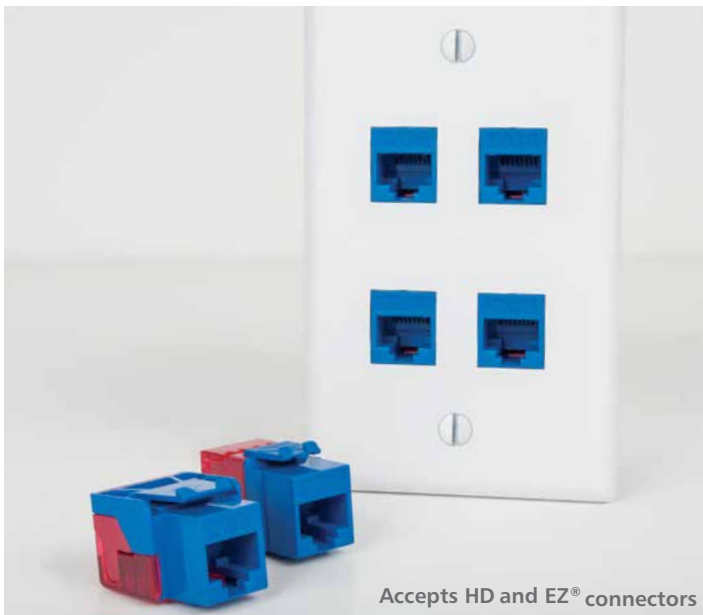


Accepts HD and EZ® connectors



Double gang, 12 ports

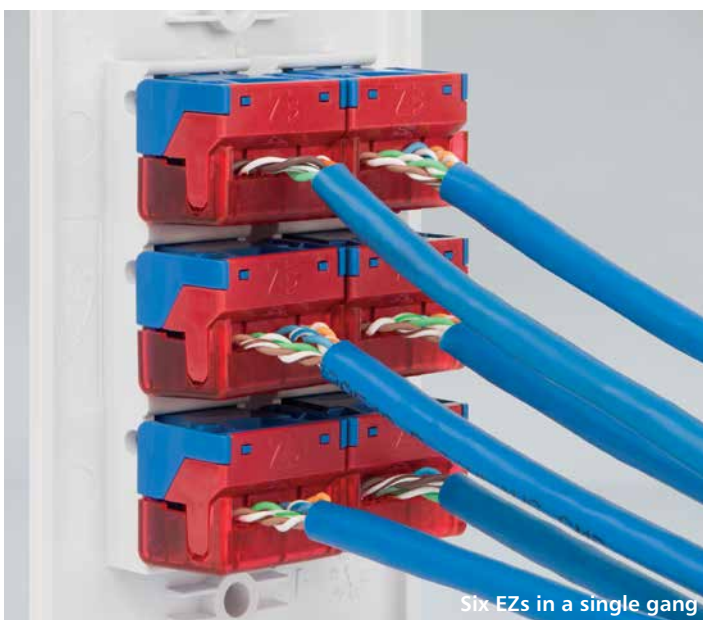

Six EZs in a single gang

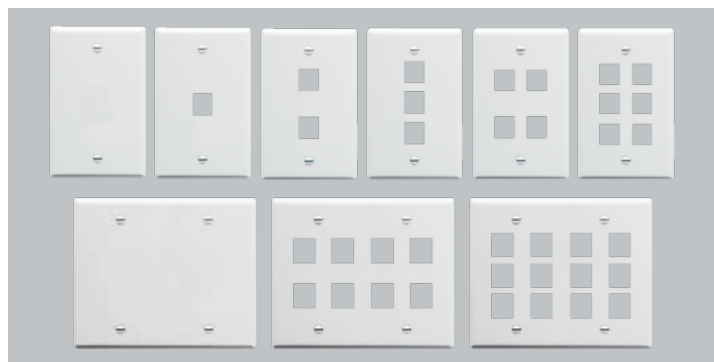

### Classic Faceplates

- Durable ABS plastic
- Rugged texture finish
- Fits NEMA size outlet box

#### Single Gang

|         |             |
|---------|-------------|
| Blank   | IC630EB0xx* |
| 1 Port  | IC107F01xx* |
| 2 Ports | IC107F02xx* |
| 3 Ports | IC107F03xx* |
| 4 Ports | IC107F04xx* |
| 6 Ports | IC107F06xx* |

#### Double Gang

|          |             |
|----------|-------------|
| Blank    | IC630EBDxx* |
| 8 Ports  | IC107FD8xx* |
| 12 Ports | IC107F12xx* |

### 25-Pack ValuePacks

- Packaged in a resealable box
- Reduces packaging waste
- Lowers the cost per unit

|         |             |
|---------|-------------|
| 1 Port  | IC107F1Cxx* |
| 2 Ports | IC107F2Cxx* |
| 3 Ports | IC107F3Cxx* |
| 4 Ports | IC107F4Cxx* |



Tab lock box

\*Color Options:  
See more at [icc.com](http://icc.com)





### Integrated Faceplates with IDC Termination

- One-piece design
- Durable ABS plastic
- Rugged texture finish

CAT 5e & F-Type ICRDS0F5WH  
 6P6C & CAT 5e ICRDSV05WH  
 6P6C, CAT 5e, & F-Type ICRDSVF5WH



### Oversized Integrated Faceplates with IDC Termination


- Designed to cover uneven and oversized drywall cuts
- Larger than standard faceplates
- Durable ABS plastic
- Rugged texture finish

CAT 5e & F-Type ICRDS0FLWH  
 6P6C & CAT 5e ICRDSV0LWH  
 6P6C, CAT 5e, & F-Type ICRDSVFLWH



### Configurable Stainless Steel

|         |            |
|---------|------------|
| Blank   | IC630EBSSS |
| 1 Port  | IC107SF1SS |
| 2 Ports | IC107SF2SS |
| 3 Ports | IC107SF3SS |
| 4 Ports | IC107SF4SS |
| 6 Ports | IC107SF6SS |

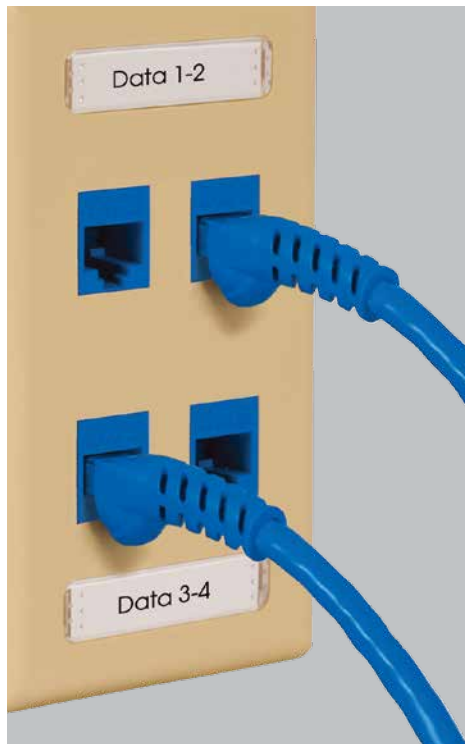

### Configurable Station ID

|         |             |
|---------|-------------|
| 1 Port  | IC107S01xx* |
| 2 Ports | IC107S02xx* |
| 3 Ports | IC107S03xx* |
| 4 Ports | IC107S04xx* |
| 6 Ports | IC107S06xx* |



### Configurable Telephone

|                         |             |
|-------------------------|-------------|
| 1 Port, ABS plastic     | IC107FFWxx* |
| 1 Port, stainless steel | IC107FFWSS  |



### Configurable Stainless Steel with ID

|         |            |
|---------|------------|
| 1 Port  | IC107S01SS |
| 2 Ports | IC107S02SS |
| 3 Ports | IC107S03SS |
| 4 Ports | IC107S04SS |
| 6 Ports | IC107S06SS |




### HD Configurable Furniture

|                                                  |             |
|--------------------------------------------------|-------------|
| <b>NEMA</b> Opening: 1.83" H x 2.60" W x 0.19" D |             |
| 4 HD Ports                                       | IC107FN4xx* |
| <b>TIA</b> Opening: 1.33" H x 2.60" W x 0.19" D  |             |
| 4 HD Ports                                       | IC107FT4xx* |



### Configurable Furniture

|                                                     |             |
|-----------------------------------------------------|-------------|
| <b>Modular</b> Opening: 1.30" H x 2.56" W x 0.19" D |             |
| 3 Ports                                             | IC107FM3xx* |

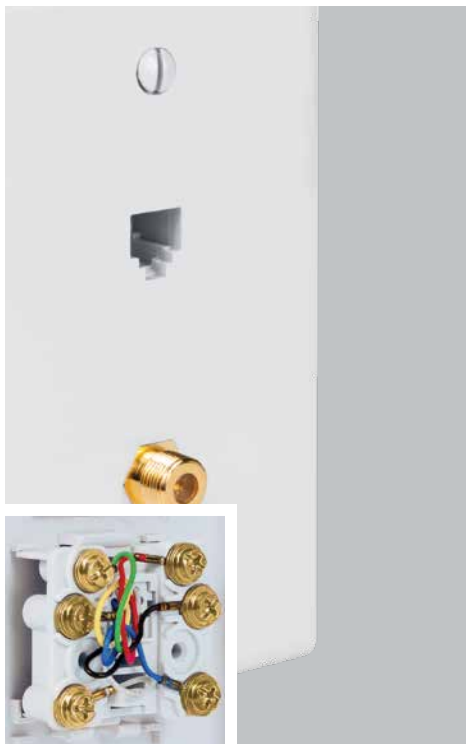

### Integrated

F-Type  
2 F-Type

#### With Screw Termination

6P6C  
2 6P6C  
6P6C and F-Type

IC630EG0xx\*  
IC630EGGxx\*

IC630E60xx\*  
IC630E66xx\*  
IC630E6GWH



### Configurable Oversized

• 3.12" W x 4.87" H

1 Port  
2 Ports  
3 Ports  
6 Ports

IC107LF1xx\*  
IC107LF2xx\*  
IC107LF3xx\*  
IC107LF6xx\*



### Configurable Angled

1 Port  
2 Ports  
4 Ports

#### With Station ID

4 Ports, 2 flat/2 angled

IC107DA1xx\*  
IC107DA2xx\*  
IC107DA4xx\*

IC107AS4WH



### Telephone

Phillips Screw Termination  
6P6C

IDC Termination  
6P6C, stainless steel

IC630DB6xx\*

IC630DA6SS



### Configurable Electrical

Faceplate  
2 Ports, Single Gang

Insert  
2 Ports  
4 HD Ports

IC106FP2xx\*

IC107DPIxx\*  
IC1074PIxx\*



### Bulk Nose

Single Gang  
Opening: 1.25" W x 0.90" D

Double Gang  
Opening: 2.75" W x 1.15" D


IC640BSxx\*

IC640BDSxx\*

\*Color Options:  
See more at [icc.com](http://icc.com)





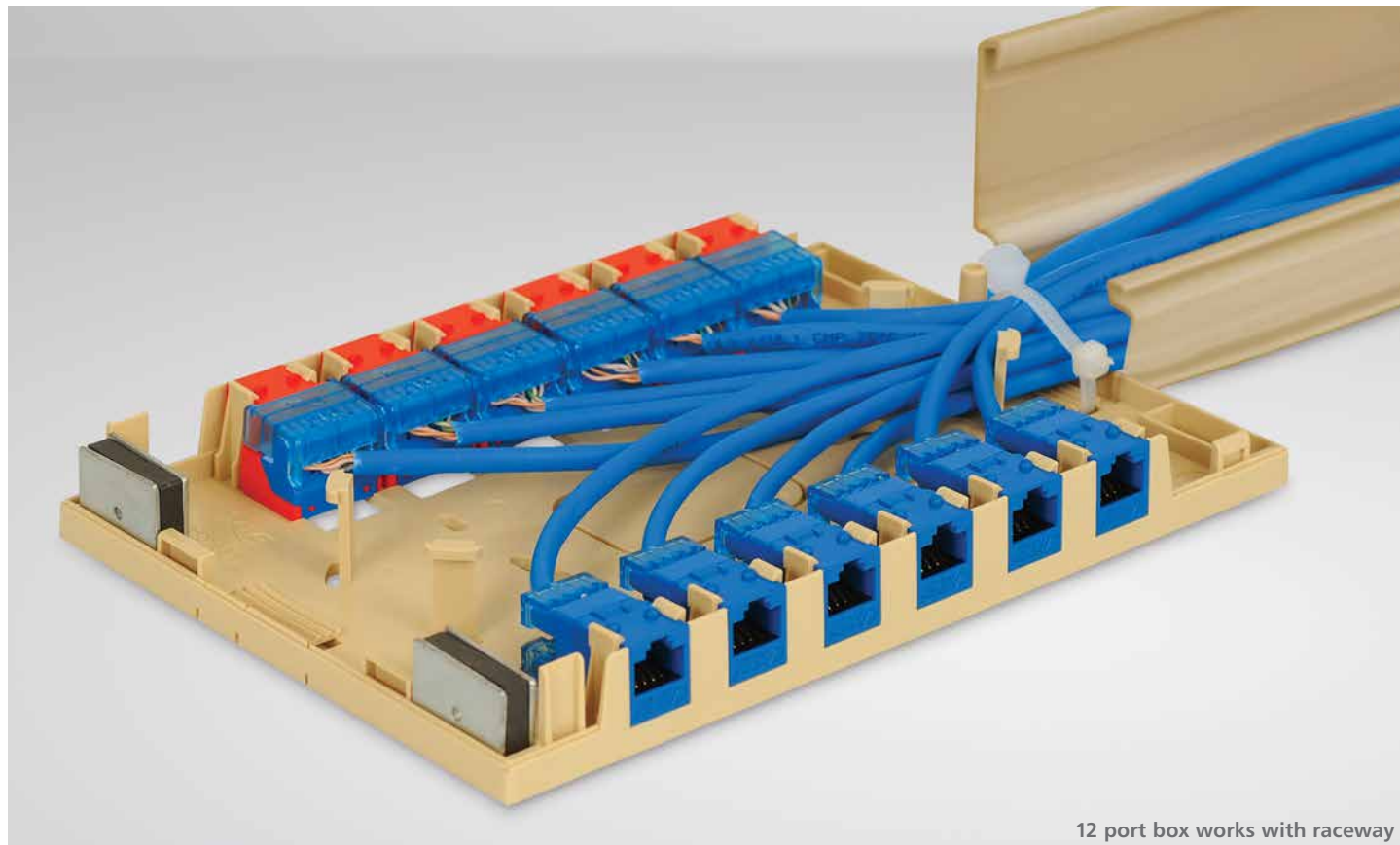

12 port box works with raceway



### Classic Configurable

- Two-piece design; cover and base
- Durable ABS plastic
- Includes adhesive strips and wood screws for mounting

1 Port  
2 Ports  
4 Ports  
6 Ports  
12 Ports

IC107SB1xx\*  
IC107SB2xx\*  
IC107SB4WH  
IC107SB6WH  
IC107SBTxx\*

## Surface Mount & Mounting Boxes






### 25-Pack ValuePacks


- Packaged in a tab lock box
- Reduces packaging waste
- Lowers the cost per unit

1 Port  
2 Ports

IC107BC1xx\*  
IC107BC2xx\*

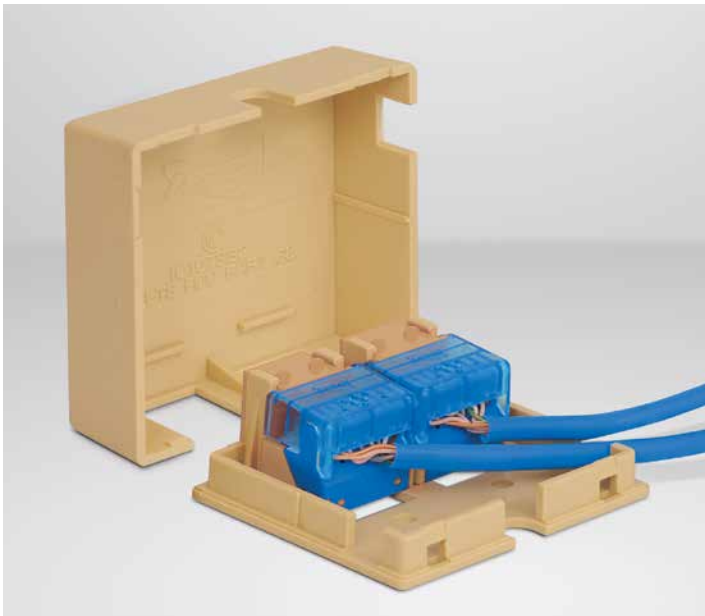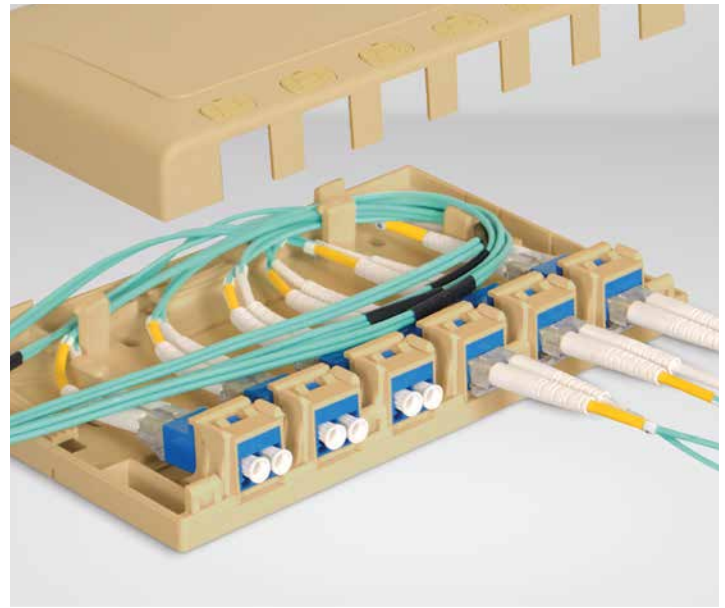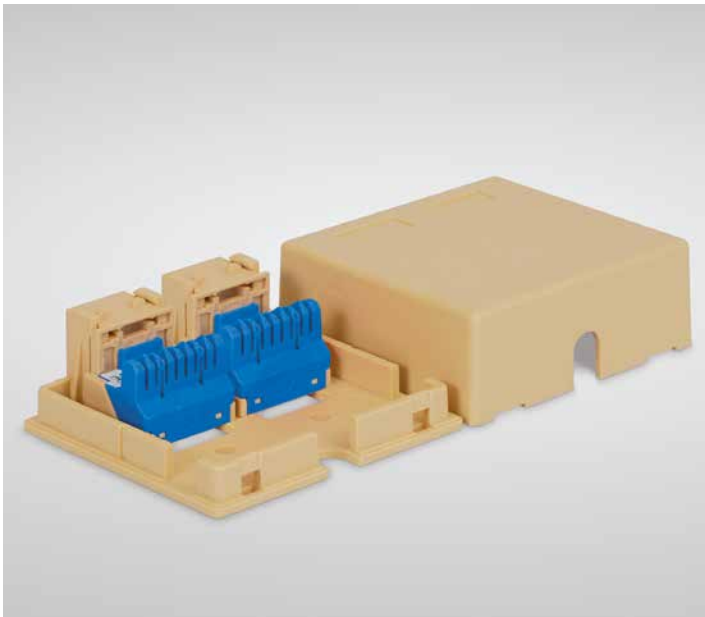

Elite boxes are raceway compatible

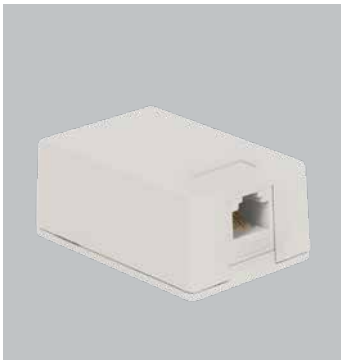

### Classic Kitted

- Kitted with EZ keystone jacks
- CAT 5e or voice
- Includes adhesive strips and wood screws for mounting

#### CAT 5e

1 Port, 1 Connector IC625S51xx\*  
2 Ports, 2 Connectors IC625S52xx\*

#### 6P6C

1 Port, 1 Connector IC625SV1V/  
2 Ports, 2 Connectors IC625SV2V

### Elite™ Configurable


- Two-piece design; cover and base
- Works with raceway and magnets
- Includes icons and mounting hardware: adhesive strips and wood screws

1 Port  
2 Ports  
4 Ports  
6 Ports

IC108SB1xx\*  
IC108SB2xx\*  
IC108SB4xx\*  
IC108SB6xx\*

\*Color Options:  
See more at [icc.com](http://icc.com)



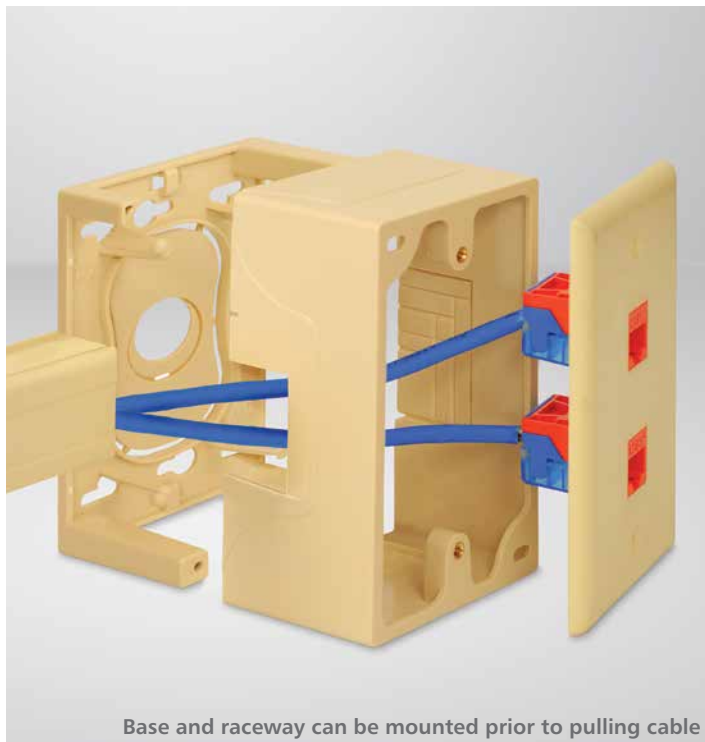

### Mounting Boxes

- Durable ABS plastic
- Includes cable ties, adhesive strips, and wood screws for mounting

Single Gang  
Double Gang

IC107MRSxx\*  
IC107MRDxx\*

### Junction Boxes

- Two-piece design; box and base
- Durable ABS plastic
- Includes cable ties, adhesive strips, and wood screws for mounting

Single Gang  
Double Gang

ICACSMBSxx\*  
ICACSMDBxx\*



### Surface Mount Jacks

- Supports voice applications
- Phillips screw down terminals
- Includes adhesive strips and wood screws for mounting

8P8C  
8P4C  
8P8C with RJ-31x

IC625SB8IV  
IC635DS4xx\*  
IC635DS8xx\*


### Mobile Patch Boxes

- Six ports of connectivity
- Works with magnets to mount on flat metal surfaces

Configurable  
CAT 6  
CAT 5e  
Magnet, 2 pcs.

IC107MB6BK  
ICMPPMB606  
ICMPPMB506  
ICMAGBLOCK



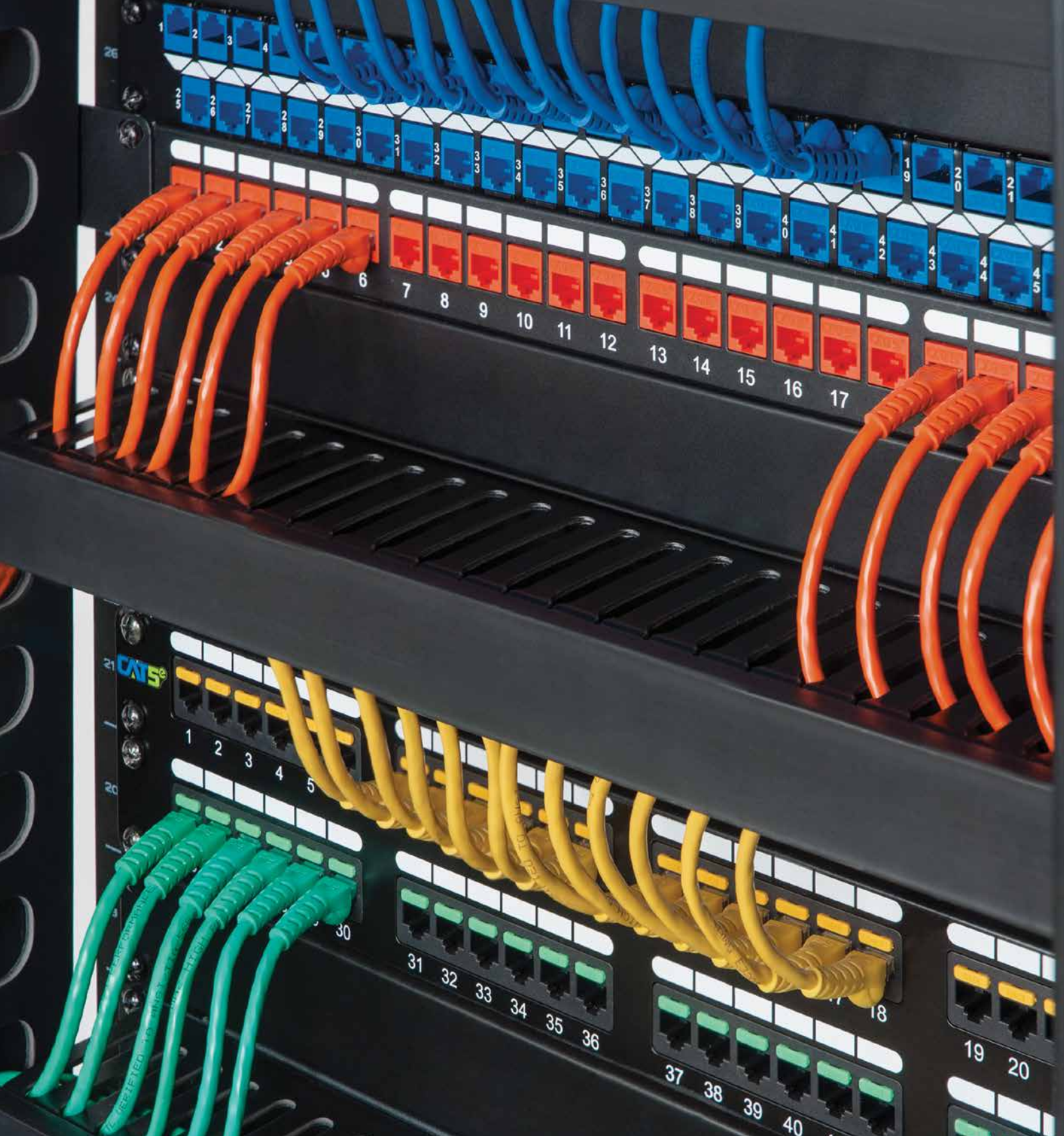

# Patch Panels & Cross-connect







## Rack Mount Patch Panels



750 plug-jack mating cycles

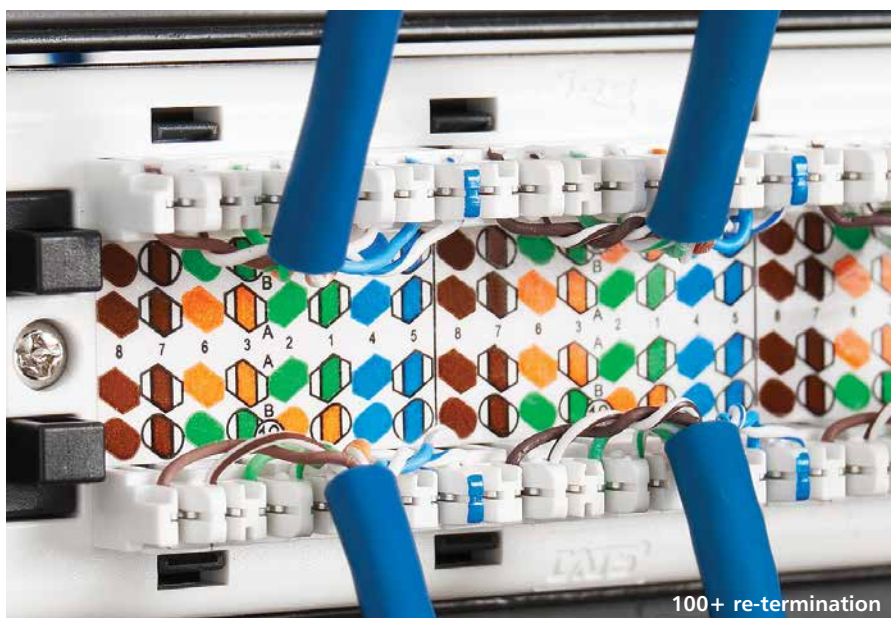

100+ re-termination

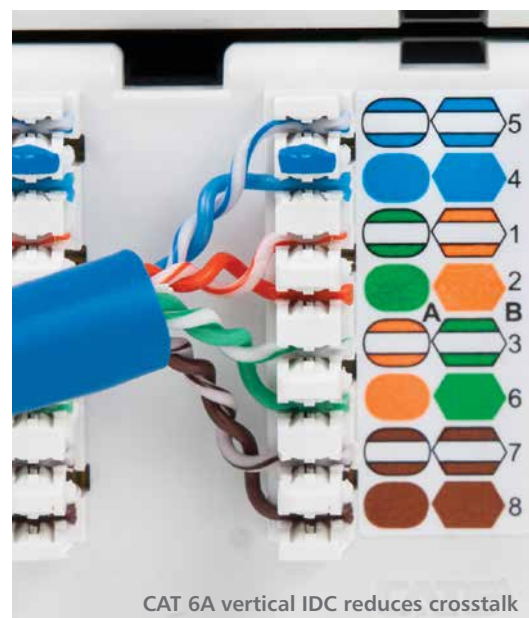

CAT 6A vertical IDC reduces crosstalk



Solderless PCB



50 micro-inch gold



## Patch Panels

- TIA® Component Rated
- IEEE 802.3 PoE Plus
- Fits 19" EIA rack mount widths
- Data Color Icons and Dust Caps, see page 31

### 24 Port, 1 RMS

CAT 6A ICMP0246B  
CAT 6 ICMP02460  
CAT 5e ICMP0245E  
6P6C, USOC ICMP024U6

### 48 Port, 2 RMS

CAT 6A ICMP0486B  
CAT 6 ICMP04860  
CAT 5e ICMP0485E  
6P6C, USOC ICMP048U6

## 6-Pack ValuePacks

- Packaged in a resealable box
- Reduces packaging waste
- Lowers the cost per unit


### 24 Port, 1 RMS

CAT 6 ICMP02460V  
CAT 5e ICMP0245EV

### 48 Port, 2 RMS

CAT 6 ICMP04860V  
CAT 5e ICMP0485EV



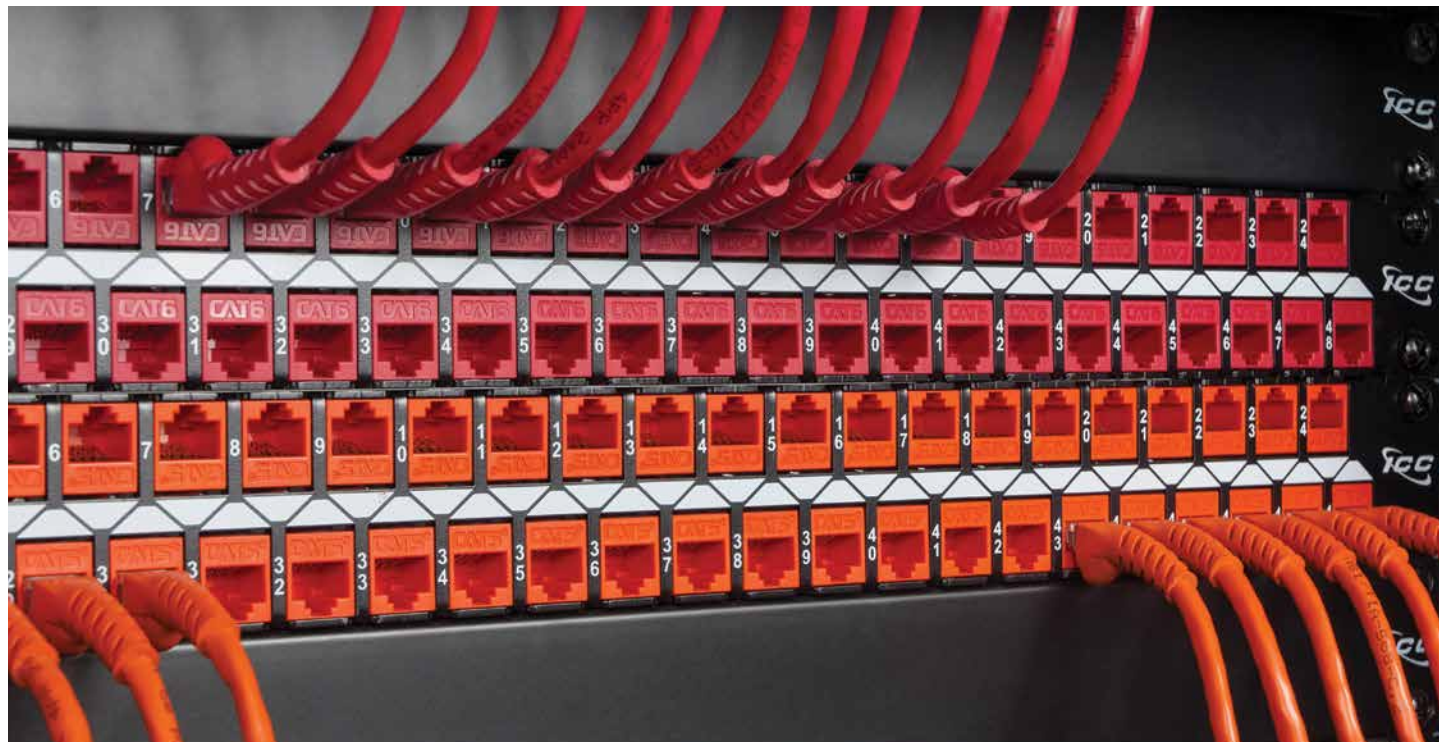

HD single row



HD/EZ® staggered row



HD dual row



## Configurable Blank Patch Panels


- Configurable with modular connectors
- Fits 19" EIA rack mount widths

### 24 Port

HD Single, 1 RMS IC107BP241  
HD/EZ Staggered, 1 RMS IC107BE241

### 48 Port

HD Dual, 1 RMS IC107BP481  
HD Dual, 2 RMS IC107BP482

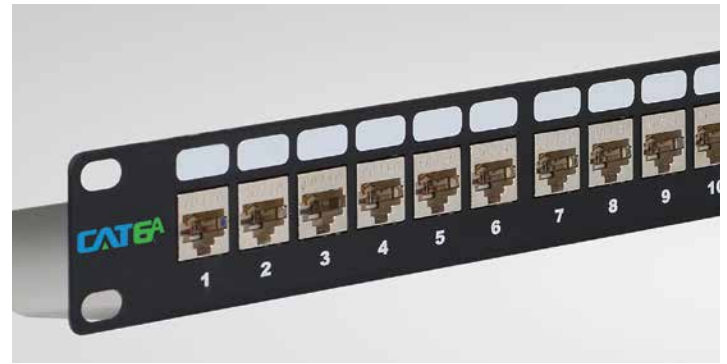


### Configurable CAT 6A UTP Patch Panels

- 24 ports
  - TIA® Component Rated
  - Shielded wire caps
  - Protects against alien crosstalk
  - Staggered ports reduce crosstalk
- |               |       |            |
|---------------|-------|------------|
| <b>Kitted</b> | 1 RMS | ICMPP246AU |
| <b>Blank</b>  | 1 RMS | IC107PPU6A |

### Configurable CAT 6A FTP Patch Panels

- 24 ports
  - Shielded 360°
  - Steel frame construction
  - Protects against EMI/RFI
  - Pre-installed grounding studs
- |               |       |            |
|---------------|-------|------------|
| <b>Kitted</b> | 1 RMS | ICMPP246AS |
| <b>Blank</b>  | 1 RMS | IC107PPS6A |
- Grounding Accessories**
- |               |            |
|---------------|------------|
| Wire, 10-Pack | ICACSGK6AS |
| Kit           | ICACSGKS00 |

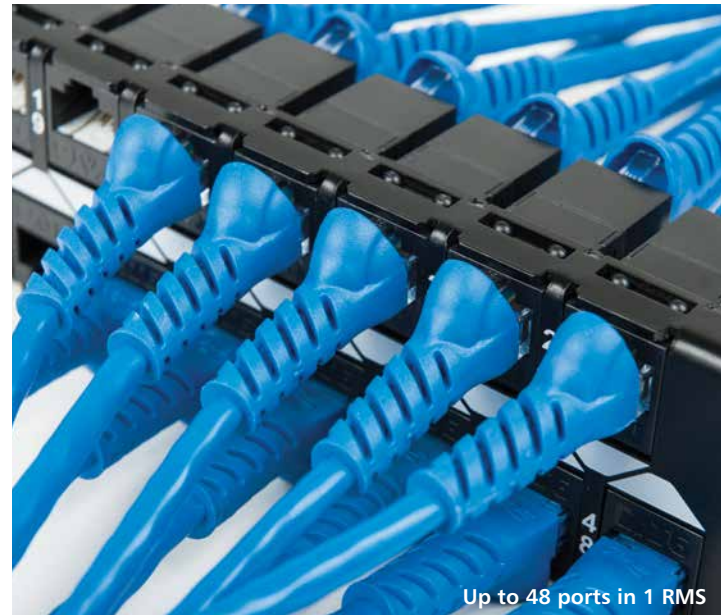


### Feed-Through Patch Panels

- TIA® Component Rated
  - Pre-installed keystone couplers
  - No termination required
  - 50 micro-inch gold plated contacts
- |                |               |            |
|----------------|---------------|------------|
| <b>24 Port</b> | CAT 6, 1 RMS  | ICMPP24CP6 |
|                | CAT 5e, 1 RMS | ICMPP24CP5 |

- |                |               |            |
|----------------|---------------|------------|
| <b>48 Port</b> | CAT 6, 1 RMS  | ICMPP48C61 |
|                | CAT 6, 2 RMS  | ICMPP48CP6 |
|                | CAT 5e, 1 RMS | ICMPP48C51 |
|                | CAT 5e, 2 RMS | ICMPP48CP5 |

Up to 48 ports in 1 RMS



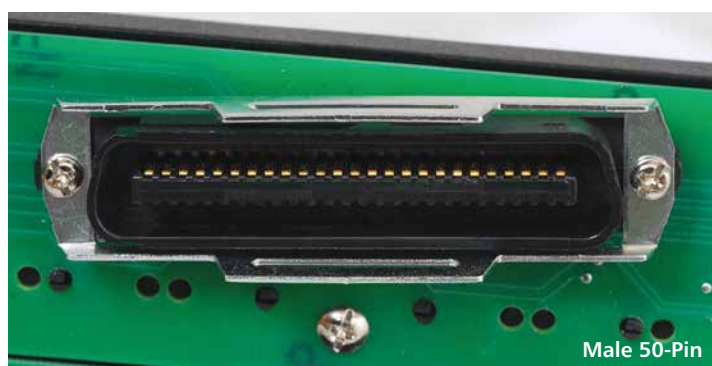

Male 50-Pin



Female 50-Pin

## Voice Patch Panels with Telco Connectors

### 8P2C

- Active pins: 4 and 5

#### Male

24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP24T2C  
ICMPP48T2C

#### Female

24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP24TF2  
ICMPP48TF2

### 8P4C

- Active pins: 4/5 and 3/6

#### Male

24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP24T4C  
ICMPP48T4C

#### Female

24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP24TF4  
ICMPP48TF4

### 6P2C

- Active pins: 3 and 4

#### Male

24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP024T2  
ICMPP048T2

#### Female

24 Port, 1 RMS

ICMPPTF242

### 6P4C

- Active pins: 3/4 and 2/5

#### Male


24 Port, 1 RMS  
48 Port, 2 RMS

ICMPP024T4  
ICMPP048T4

#### Female

24 Port, 1 RMS

ICMPPTF244

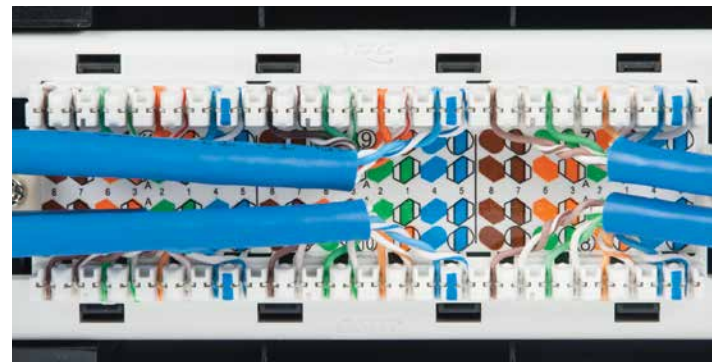

## Wall Mount Patch Panels



### Integrated with IDC Termination

- 12 ports
- TIA® Component Rated
- Install on wall and racks
- 10" H x 3.30" W x 2.40" D
- Two-piece design; patch panel with 89D mounting bracket

CAT 6 ICMPP12V60  
CAT 5e ICMPP12V5E  
6P6C, USOC ICMPP012U6

#### Patch Panel Color Icons

Data Icons, 120-Pack ICMPPICSxx\*

#### Dust Cover ValuePacks

10-Pack ICACSDCICL  
100-Pack ICACSDCVCL

### 6-Pack ValuePacks

- Packaged in a resealable box
- Reduces packaging waste
- Lowers the cost per unit

CAT 6  
CAT 5e

ICMPP1260V  
ICMPP125EV

\*Color Options:







### Front Access Zero-U Patch Panels

- 12 ports
- TIA® Component Rated
- Install on wall
- 110-Type IDC terminations
- Removable cover

CAT 6  
CAT 5e

ICMPP12F6E  
ICMPP12F5E






### Configurable Blank Patch Panels

- Install on wall
- 10" H x 3.30" W x 2.40" D
- Configurable with modular connectors
- Two-piece design; patch panel with 89D mounting bracket

12 HD Ports  
8 HD/EZ Ports

IC107BP12V  
IC107BP8VB



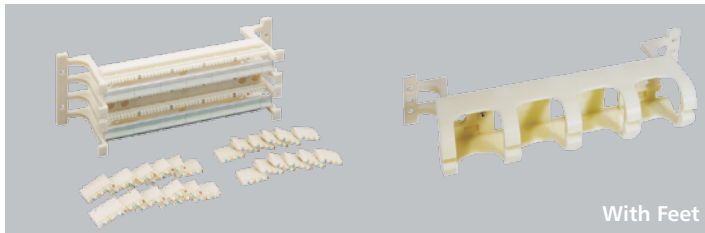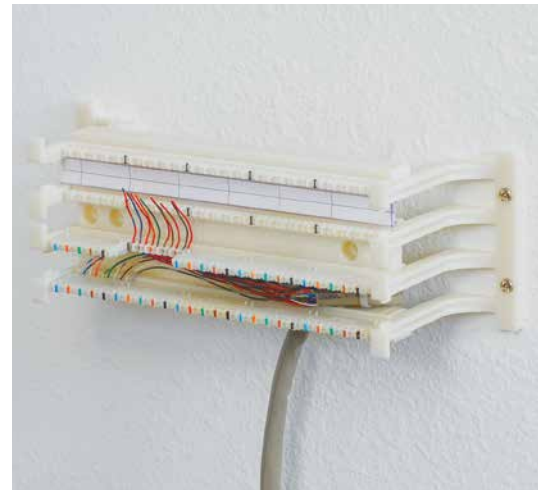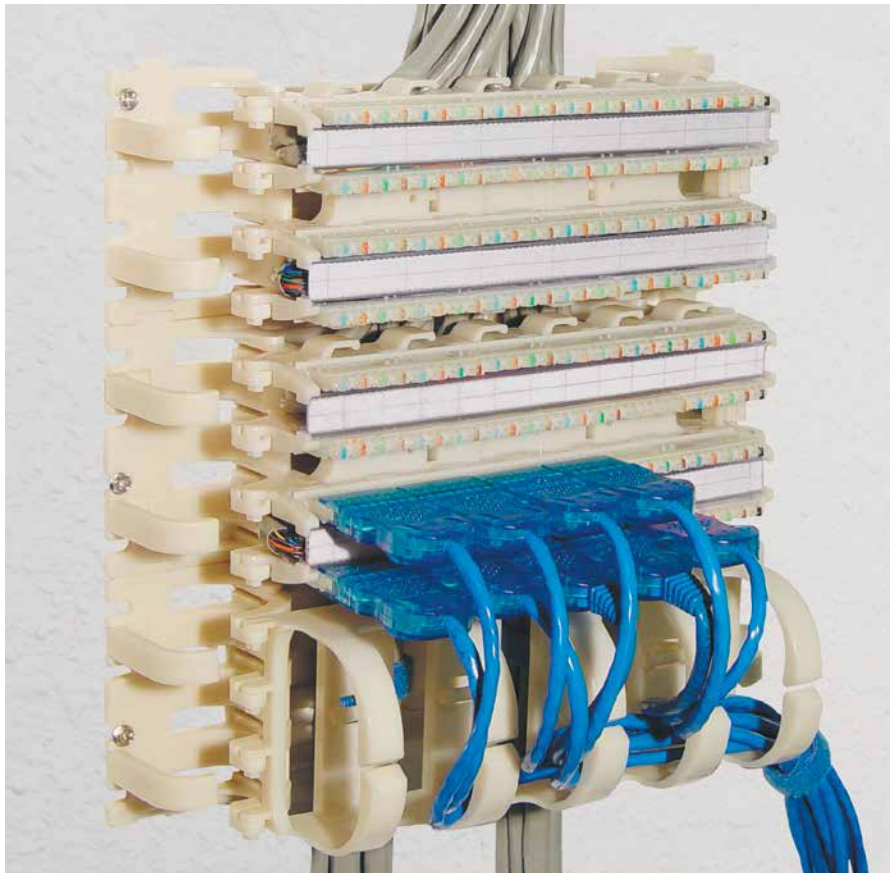


With Feet

# 110 Wiring



Hinged

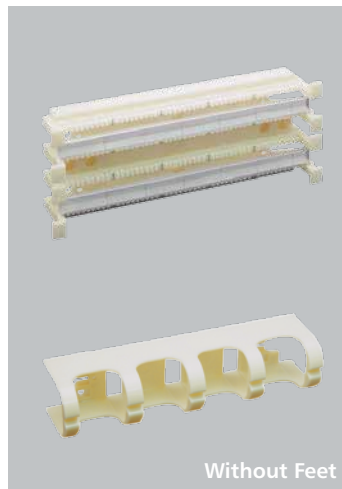

Without Feet



Rack Mount

## Kits

- Includes a wiring block with feet
- Includes 110 connecting blocks

### CAT 5e

100-Pair IC110W1004  
300-Pair IC110W3004  
100-Pair, Hinged IC110H1004

### CAT 6

96-Pair IC110WK966

## Wiring Blocks

100-Pair with Feet IC110WF100  
300-Pair with Feet IC110WF300  
100-Pair without Feet IC110NF100  
100-Pair, Hinged IC110WH100

### Cable Managers

With Feet IC110CMBWF  
Without Feet IC110CMBNF

## Patch Panels

96-Pair CAT 6 Kit  
100-Pair  
200-Pair  
Cable Manager

IC110PRK61  
IC110RM100  
IC110RM200  
IC110RMCMB


## Accessories

### Connecting Blocks 100-Packs



4-Pair IC110CB4PC  
5-Pair IC110CB5PC

### Other

Label Holder, 6-Pack IC110LHLDR  
Wire Cap, 50-Pack IC110TC450

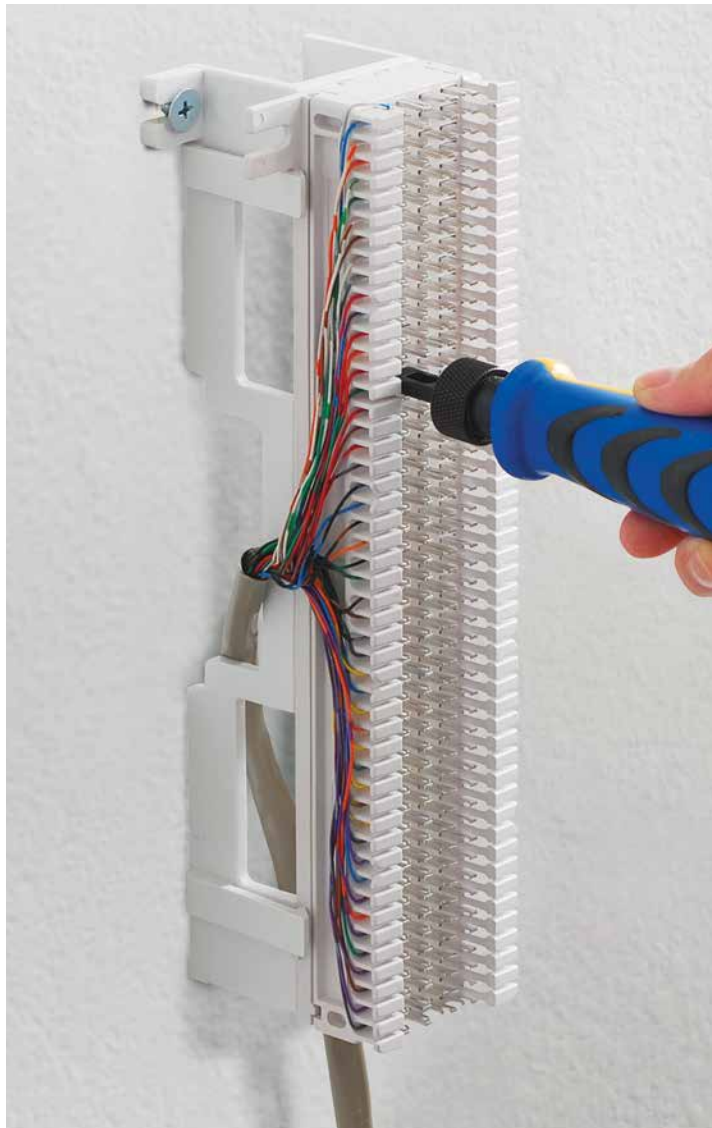

## 66 Wiring

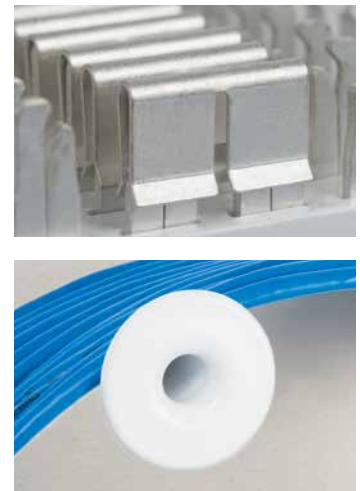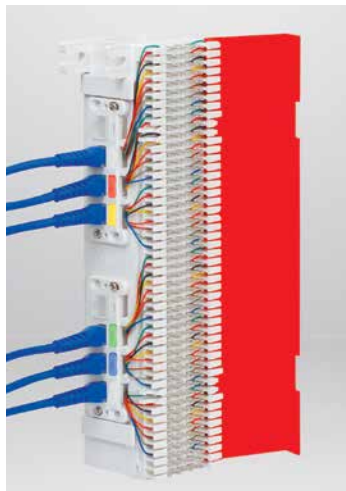

### 50-Pair Wiring Blocks

25-Pack ValuePack  
Single Block

IC066NBC50  
IC066NB050

### Pre-wired Blocks

- Includes 89D Mounting Bracket
- Includes Removable Hinged Cover

#### Data

12 Ports, 8P8C IC06628P8C

#### Voice

8 Ports, 6P6C IC06686P6C  
12 Ports, 6P4C IC06626P4C

#### Telco

1 25-Pair Female IC066SFT25  
2 25-Pair Female IC066DFT50

### 89B Mounting Brackets

25-Pack ValuePack  
Single Bracket

ICMB89BCWH  
ICMB89B0WH

### Accessories

Block Clear Cover  
Bridge Clips, 100-Pack

IC066CV050  
IC066BRCLP

#### Spools 10-Pack ValuePacks

Built-in wood screw  
Without screw


ICACSWDS20  
ICACSWDS10





# Premise Cables




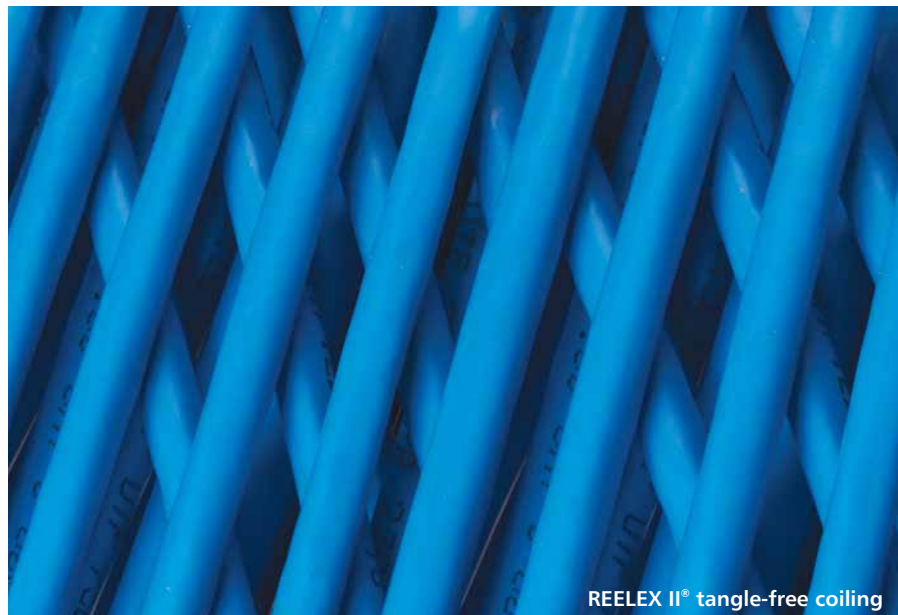

REELEX II® tangle-free coiling



Pull box packaging

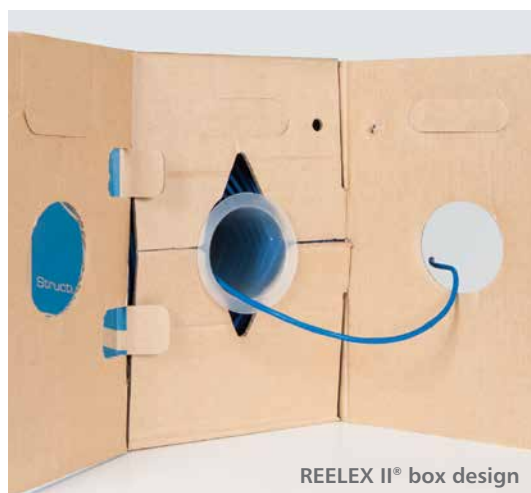

REELEX II® box design






CAT 6A reel packaging



Big payout tube

## Packaging


Premise cables come packaged in a double-layered carton which strengthens the carton's durability to prevent tearing. CAT 6A premise cables come packaged on a wooden reel to reduce stress when pulling cable.

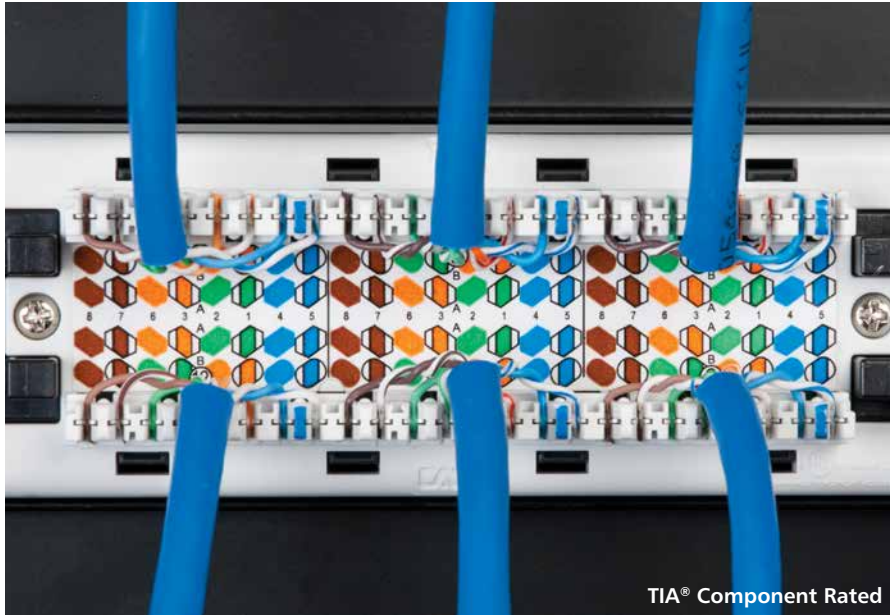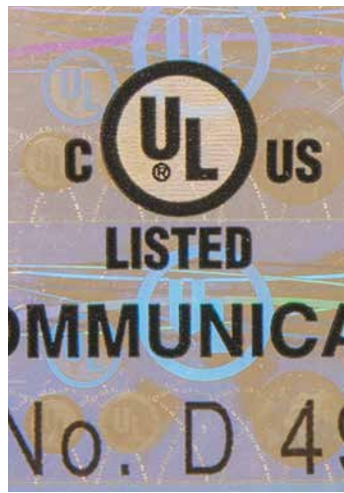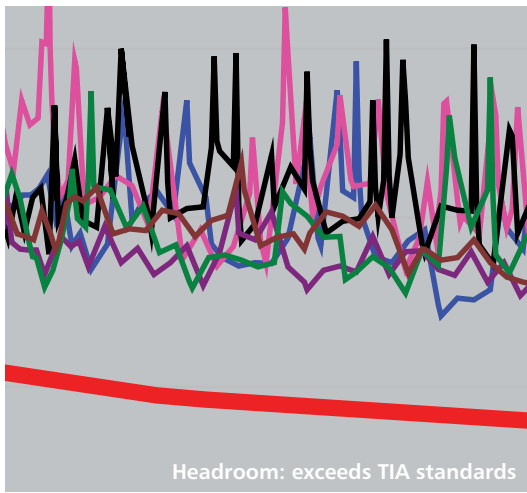

## Performance

ICC Premise Cables are tested to meet and exceed TIA<sup>®</sup> industry performance standards and comply with the strict TIA, UL<sup>®</sup>, and RoHS<sup>®</sup> (Restriction of Hazardous Substance) standards.



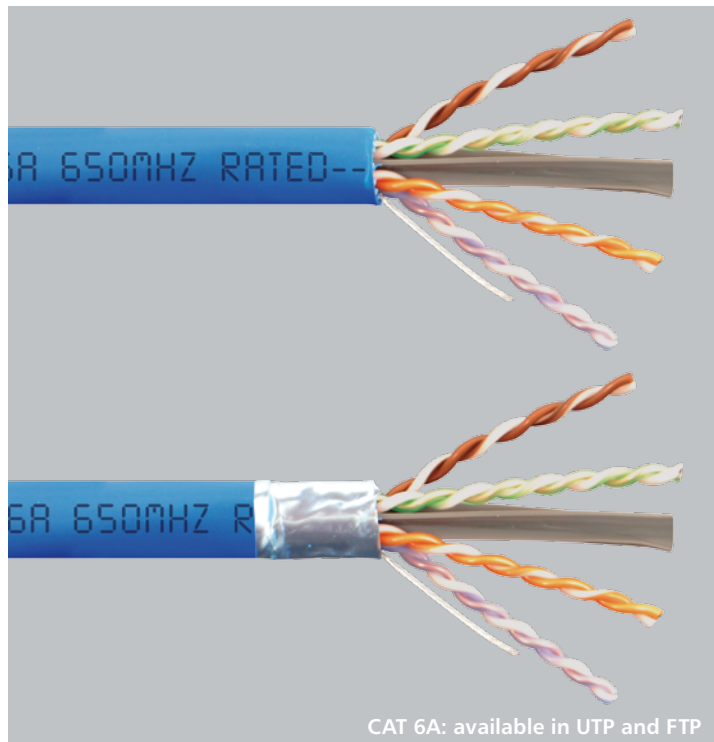

CAT 6A: available in UTP and FTP




Sequential footage markings




Bare solid copper



X separator: reduces crosstalk

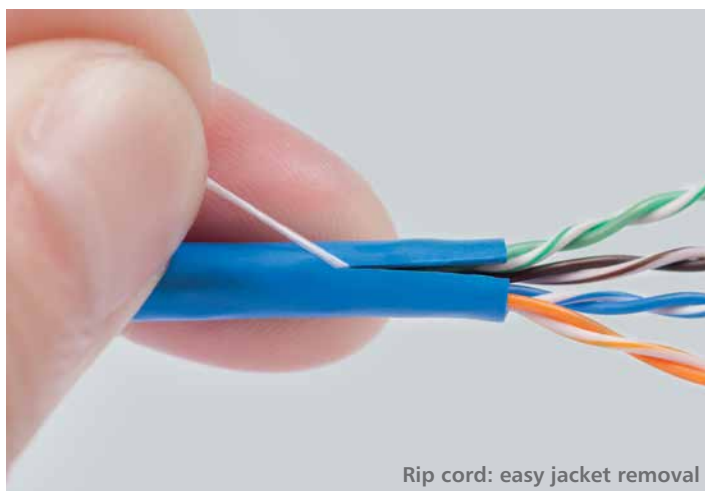

Rip cord: easy jacket removal

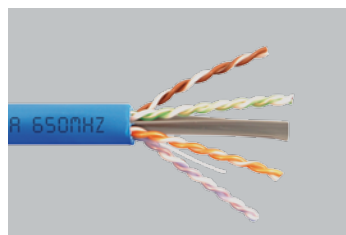

#### CAT 6A 650 MHz

- 1000 feet per reel

##### UTP

Riser  
Plenum


ICCABR6Axx<sup>1</sup>  
ICCABP6Axx<sup>1</sup>

<sup>1</sup>Available in: BL, WH

##### FTP

Riser  
Plenum

ICCABR6FBL  
ICCABP6FBL

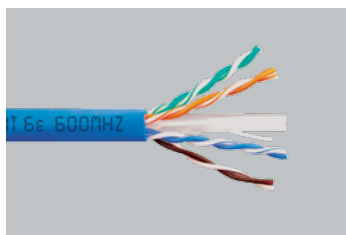


#### CAT 6e UTP 600 MHz

- 1000 feet per box

Riser  
Plenum


ICCABR6Exx<sup>2</sup>  
ICCABP6Exx<sup>2</sup>

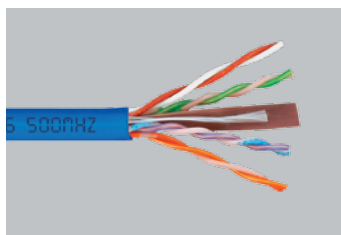

#### CAT 6 UTP 500 MHz

- 1000 feet per box

Riser, no tape separator ICCABR6Vxx<sup>2</sup>  
Plenum, tape separator ICCABP6Vxx<sup>2</sup>

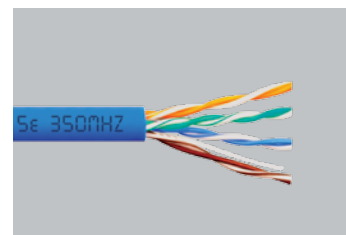

#### CAT 5e UTP 350 MHz

- 1000 feet per box


Riser  
Plenum

ICCABR5Exx<sup>2</sup>  
ICCABP5Exx<sup>2</sup>

<sup>2</sup>Color Options:





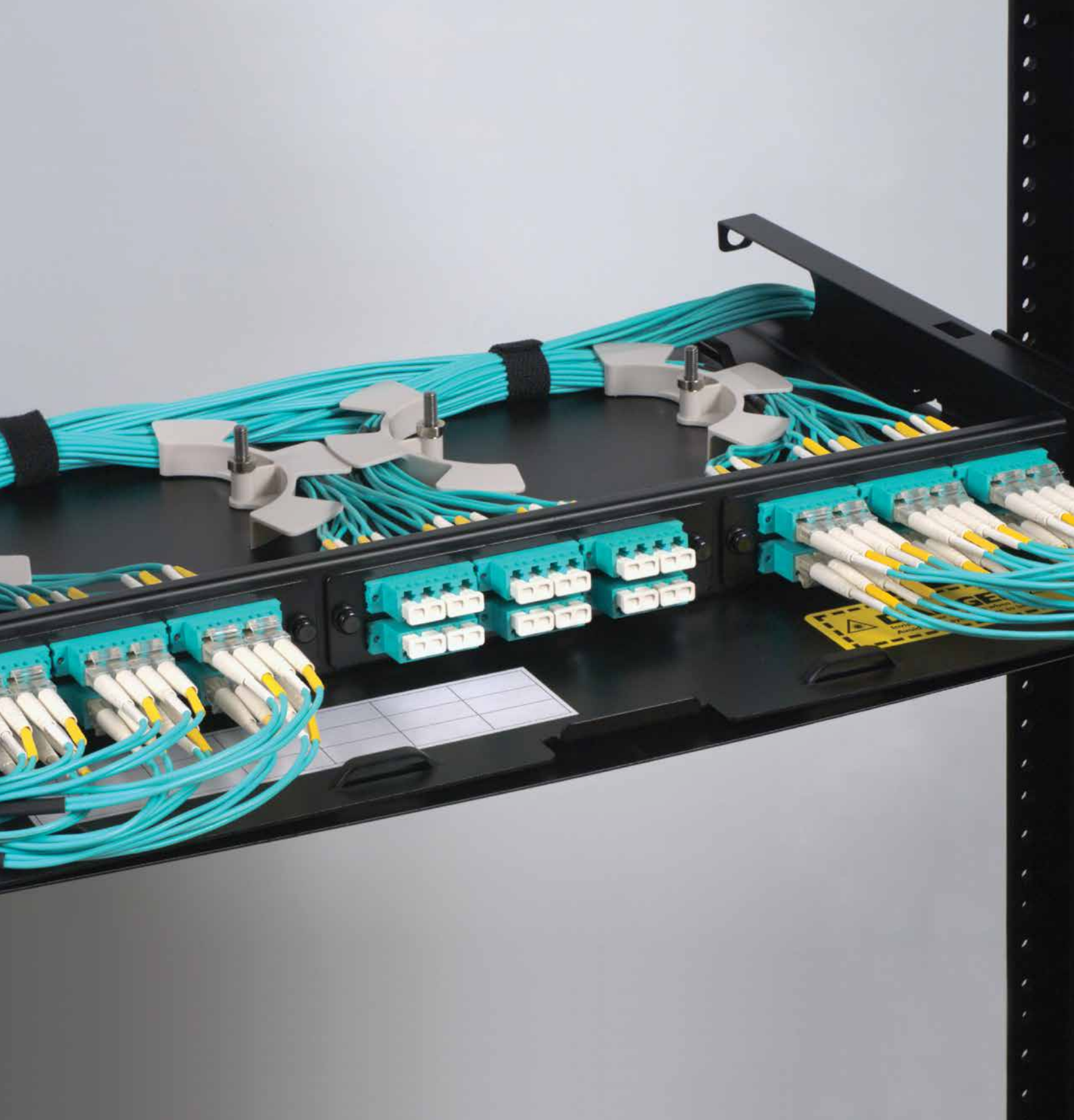


# Fiber Optic System



## Enclosure Solutions

LGX® compatible fiber optic enclosures include covers and doors to protect fiber connectivity. Wall mount enclosures come with a locking door to provide extra protection for installations in unsecured areas.



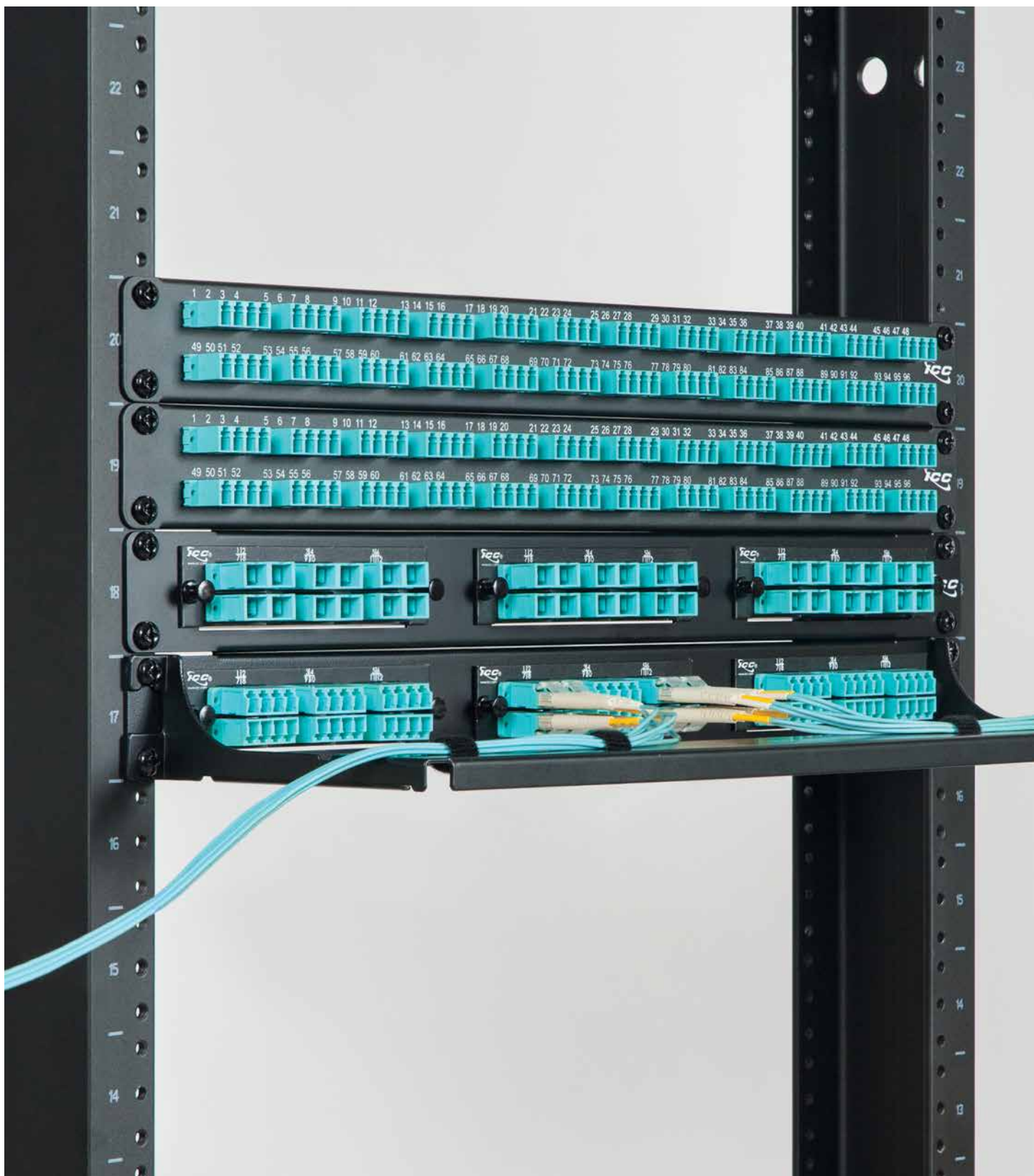

## Panel Solutions

Fiber optic patch panels provide a cost-effective solution in an open frame environment. LGX® compatible panels are configurable with fiber adapter panels and MPO cassettes making moves, adds, and changes easy.





## Fiber Optic Enclosures



### Rack Mount Enclosures, 12.6" Depth

- Configurable with LGX® compatible adapter panels and LGX compatible MPO cassettes
- 20 GA steel, powder-coated black
- Slide-out tray
- Holds one splice tray
- Fits 19" EIA rack mount widths

|                      |            |
|----------------------|------------|
| 3 Panel, 1 RMS       | ICFORE31RM |
| 6 Panel, 2 RMS       | ICFORE62RM |
| 12 Panel, 4 RMS      | ICFORET4RM |
| 12 fiber splice tray | ICFOSKFM12 |

### Rubber Grommets, 20-Pack

|                     |            |
|---------------------|------------|
| 25.4mm (1 RMS)      | ICFORECAC2 |
| 38.10mm (2 & 4 RMS) | ICFORECAC3 |




### Wall Mount Enclosure, 3.5" Depth

- Configurable with LGX compatible adapter panels and LGX compatible MPO cassettes
- Single locking door design
- Includes four hook and loop Velcro® cable ties
- Holds one splice tray
- 10.75" H x 13" W

|                      |            |
|----------------------|------------|
| 4 Panel              | ICFODE41WM |
| 12 fiber splice tray | ICFOSKFM12 |

### Rubber Grommets, 20-Pack

|         |            |
|---------|------------|
| 38.10mm | ICFORECAC3 |
|---------|------------|

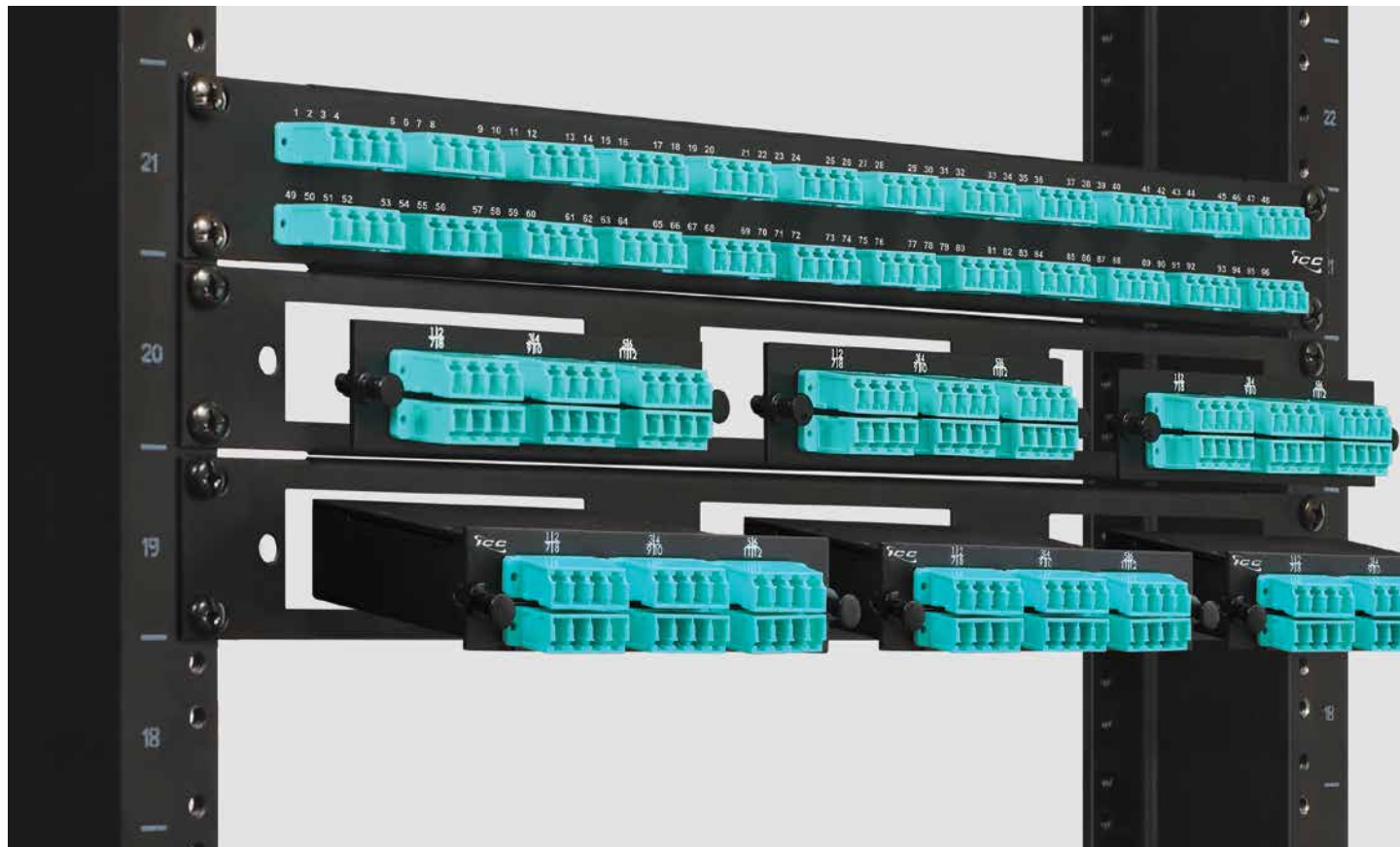

### HD LC Quad Fiber Patch Panel, 96 Fibers

- Loaded with 24 LC to LC quad adapters
- Fits 19" EIA rack mount widths
- Includes dust caps

LC quad patch panel, 10G aqua adapters, 1 RMS

ICFP96ML1G

## Fiber Optic Connectivity




### Blank Fiber Patch Panel

- Configurable with LGX compatible adapter panels and LGX MPO cassettes
- Fits 19" EIA rack mount widths

3 Panel, 1 RMS

ICFORPP1RM



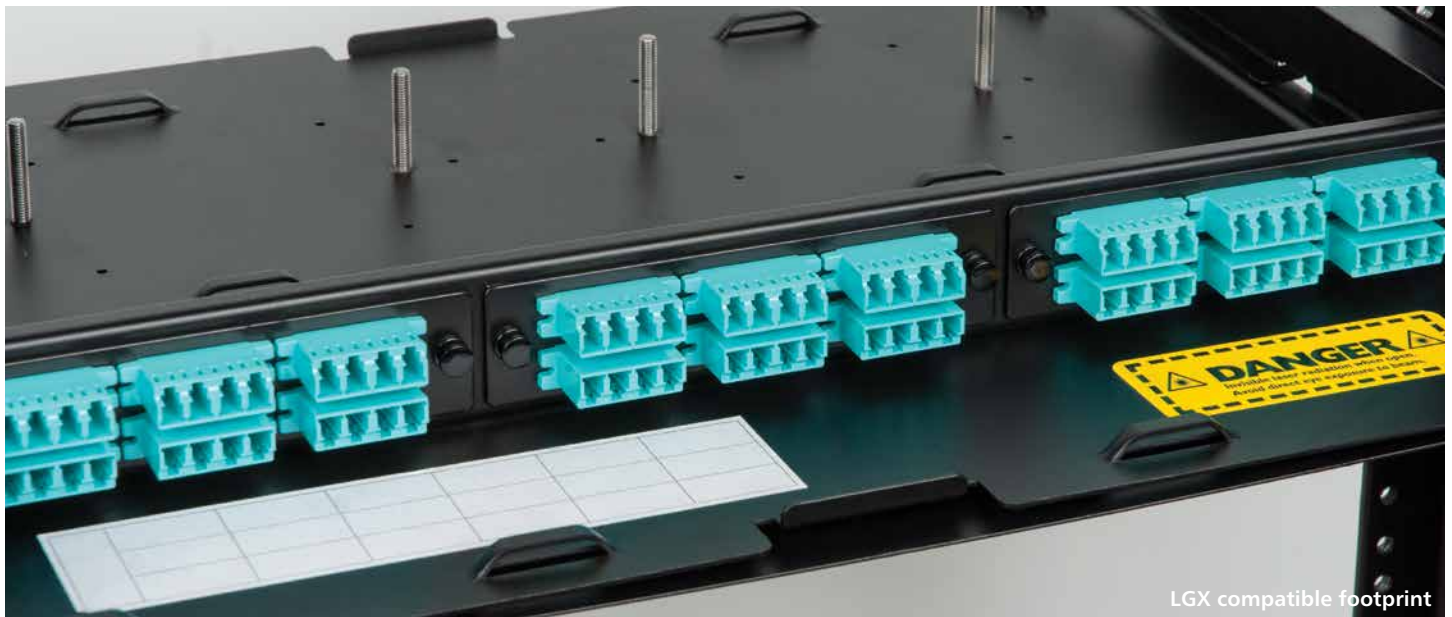

LGX compatible footprint



288 fibers in 4 RMS



LC-LC 24 fibers



LC-LC 12 fibers



SC-SC 12 fibers



ST-ST 6 fibers

## Adapter Panels

### LC to LC

24 fibers, MM, 10G, aqua  
24 fibers, MM, beige  
24 fibers, SM, blue  
12 fibers, MM, 10G, aqua  
12 fibers, MM, beige  
12 fibers, SM, blue

### Blank Panel

Blank, cover unused panel openings

ICFOPL161G  
ICFOPL1615  
ICFOPL1619  
ICFOPL16BG  
ICFOPL16B5  
ICFOPL16BK

ICFOPB00BK

### SC to SC

12 fibers, MM, 10G, aqua  
12 fibers, MM, beige  
12 fibers, SM, blue  
6 fibers, MM, beige  
6 fibers, SM, blue

### ST to ST

6 fibers, MM, beige  
6 fibers, SM, blue

ICFOPC161G  
ICFOPC16BK  
ICFOPC26BK  
ICFOPS16BK  
ICFOPS26BK

ICFOPT16BK  
ICFOPT26BK



Removable snap-in cassette

## HD Cassette Patch Panels



Rear male MPO connectors


### HD MPO Cassette Panels

- Built with pre-terminated LC or SC to MPO cassettes
- One MPO connector supports twelve fibers
- Interchangeable cassettes, remove using a screwdriver
- Fits 19" EIA rack mount widths
- Includes dust caps
- Supports migration from 10G to 40G and 100G

|               | LC 24 Fibers | SC 12 Fibers |
|---------------|--------------|--------------|
| OM3, 50/125   | ICFC24MLPG   | ICFC12MSPG   |
| OM2, 50/125   | ICFC24MLP5   | ICFC12MSP5   |
| OM1, 62.5/125 | ICFC24MLP6   | ICFC12MSP6   |
| OS1, 9/125    | ICFC24SLP9   | ICFC12SSP9   |



## MPO Cassettes

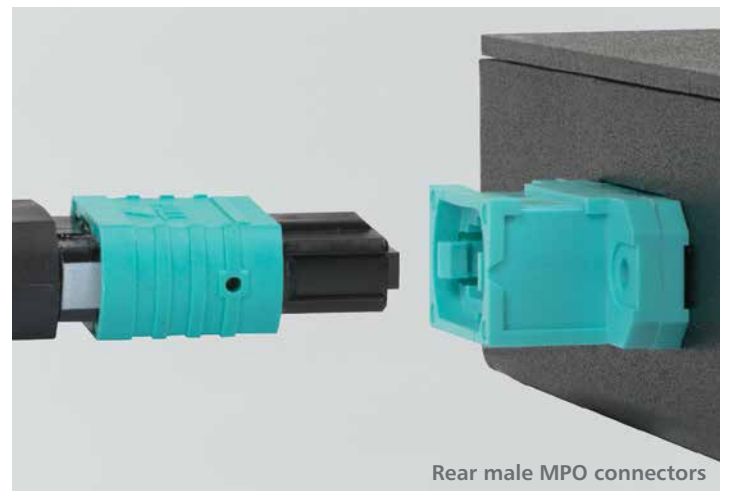


### MPO Cassettes


- LGX compatible footprint
- Factory terminated and tested
- Includes dust caps and performance results
- Low Insertion Loss of <0.5dB
- Equipped with male MPO connectors on the rear

|               | LC 24 Fibers | LC 12 Fibers | SC 12 Fibers |
|---------------|--------------|--------------|--------------|
| OM3, 50/125   | ICFC24ML1G   | ICFC12ML1G   | ICFC12MS1G   |
| OM2, 50/125   | ICFC24ML50   | ICFC12ML50   | ICFC12MS50   |
| OM1, 62.5/125 | ICFC24MLD6   | ICFC12MLD6   | ICFC12MSD6   |
| OS1, 9/125    | ICFC24SLD9   | ICFC12SLD9   | ICFC12SSD9   |




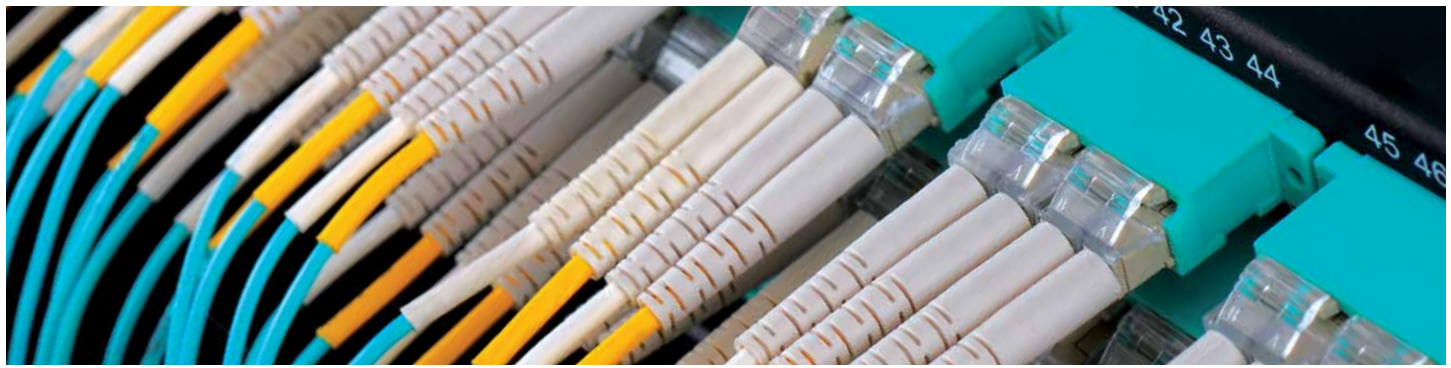

We offer tools to help remove connectors

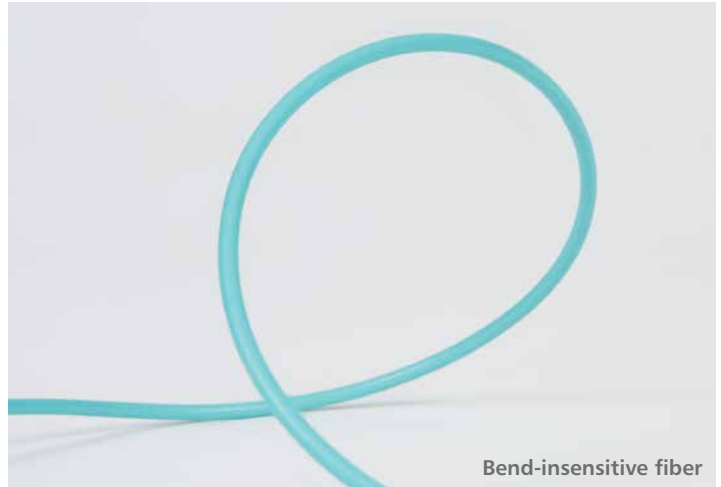

Bend-insensitive fiber

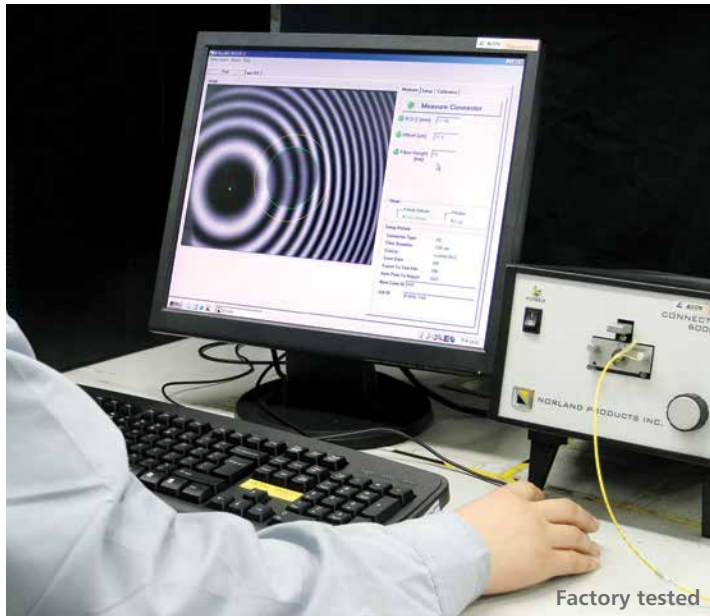


Factory tested


## Fiber Optic Patch Cords




Dust caps are included for protection

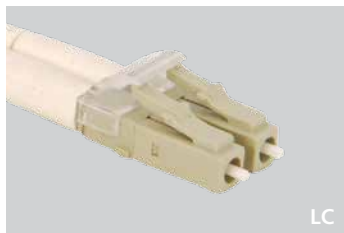


LC

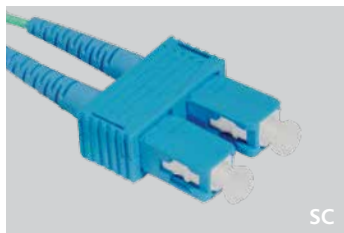

SC

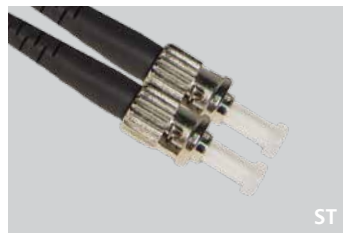

ST

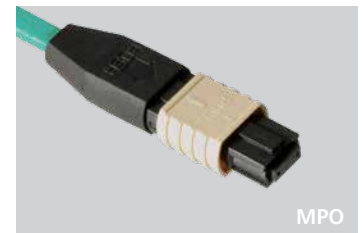

MPO

### Duplex Patch Cords, OFNR

- Lengths (zz\*) = 01, 02, 03, 05, 07, and 10 meters

|          | OM3 50/125  | OM2 50/125  | OM1 62.5/125 | OS1 9/125   |
|----------|-------------|-------------|--------------|-------------|
| LC to LC | ICFOJ1G7zz* | ICFOJ1M7zz* | ICFOJ1M3zz*  | ICFOJ1M5zz* |
| LC to SC | ICFOJ2G7zz* | ICFOJ2M7zz* | ICFOJ2M3zz*  | ICFOJ2M5zz* |
| LC to ST | -           | ICFOJ3M7zz* | ICFOJ3M3zz*  | ICFOJ3M5zz* |
| SC to SC | ICFOJ8G7zz* | ICFOJ8C7zz* | ICFOJ8C3zz*  | ICFOJ8C5zz* |
| SC to ST | -           | ICFOJ9C7zz* | ICFOJ9C3zz*  | ICFOJ9C5zz* |
| ST to ST | -           | ICFOJ7C7zz* | ICFOJ7C3zz*  | ICFOJ7C5zz* |

### MPO Patch Cords, OFNP, 12 Fibers

- Lengths (zz\*) = 05, 10, 15, 20, 30, and 50 meters

|               |             |
|---------------|-------------|
| OM3, 50/125   | ICFOJATGzz* |
| OM2, 50/125   | ICFOJATMzz* |
| OM1, 62.5/125 | ICFOJATNzz* |
| OS1, 9/125    | ICFOJATSzz* |



# Racks & Cable Management





## Hinged Brackets

- Limited space/closet installations
- Available in EZ-Fold or traditional style
- Supports up to 60 lb. of equipment

## Open Frame Racks

- Limited floor space/small room installations
- Self-squaring design; easy to assemble
- Supports up to 125 lb. of equipment





## Enclosed Cabinets

- Small room/space for swing out
- For secure and non-secure installations
- Swings out to access equipment from the rear
- Supports up to 150 lb. of equipment



## Floor Racks

- Regulation size telecom rooms
- Available with 2 and 4 posts
- Supports up to 1500 lb. of equipment



## Racks



### Wall Mount Hinged Brackets, 6" Depth

- |                         |               |            |
|-------------------------|---------------|------------|
| • Up to 40 lb. capacity | 1 RMS, 2-Pack | ICCMShB1RC |
|                         | 1 RMS         | ICCMShB1RS |
|                         | 2 RMS, 2-Pack | ICCMShB2RC |
|                         | 2 RMS         | ICCMShB2RS |
|                         | 4 RMS, 2-Pack | ICCMShB4RC |
|                         | 4 RMS         | ICCMShB4RS |

### Wall Mount EZ-Fold Brackets, 15" Depth

- |                                |       |            |
|--------------------------------|-------|------------|
| • 30 lb. capacity              | 2 RMS | ICCMSABRS2 |
| • 2.5" height                  | 4 RMS | ICCMSABRS4 |
| • Double mounting holes        | 6 RMS | ICCMSABRS6 |
| • No weight bears at the hinge | 8 RMS | ICCMSABRS8 |
| • Patented                     |       |            |



### Wall Mount EZ-Fold Brackets, 6" Depth

- |                                |       |            |
|--------------------------------|-------|------------|
| • 30 lb. capacity              | 2 RMS | ICCMSABR62 |
| • 2.5" height                  | 4 RMS | ICCMSABR64 |
| • Double mounting holes        | 6 RMS | ICCMSABR66 |
| • No weight bears at the hinge | 8 RMS | ICCMSABR68 |
| • Patented                     |       |            |

### Wall Mount Vertical Hinged Brackets

- |                         |                  |            |
|-------------------------|------------------|------------|
| • Up to 60 lb. capacity | 6 RMS, 12" Depth | ICCMSVHB06 |
| • Swings down 90°       | 8 RMS, 12" Depth | ICCMSVHB08 |
|                         | 8 RMS, 18" Depth | ICCMSVHB18 |





### Wall Mount Racks, 18" Depth

- |                                    |        |            |
|------------------------------------|--------|------------|
| • 125 lb. capacity                 | 8 RMS  | ICCMSWMR08 |
| • Reinforced arms with 14 GA steel | 15 RMS | ICCMSWMR15 |
|                                    | 30 RMS | ICCMSWMR30 |



### Wall Mount Swing Frame Racks, 18" Depth

- |                                    |        |           |
|------------------------------------|--------|-----------|
| • 85 lb. capacity                  | 12 RMS | ICCMSFR12 |
| • Reversible installation          | 25 RMS | ICCMSFR25 |
| • Mounting screw template included |        |           |



### Wall Mount Enclosure Cabinets, 26" Depth

- |                                               |                        |            |
|-----------------------------------------------|------------------------|------------|
| • 150 lb. capacity                            | <b>Solid Door</b>      |            |
| • Vented side panels                          | 12 RMS                 | ICCMSWMC12 |
| • Knockouts on top and bottom for cable entry | 26 RMS                 | ICCMSWMC26 |
| • Reversible front door                       | <b>Plexiglass Door</b> |            |
|                                               | 12 RMS                 | ICCMSWMP12 |
|                                               | 26 RMS                 | ICCMSWMP26 |



### Wall Mount Utility Rack

- |                                     |       |            |
|-------------------------------------|-------|------------|
| • 75 lb. capacity                   | 5 RMS | ICCMSWMUR5 |
| • Mounts equipment vertically       |       |            |
| • Pre-assembled with swing out arms |       |            |



### 2-Post Distribution Racks

- Lightweight aluminum
- 19" EIA rack mount width
- 750 lb. capacity

7' H, 45 RMS  
6' H, 38 RMS  
4' H, 24 RMS  
Anchor Kit

ICCMSR1984  
ICCMSR1972  
ICCMSR1948  
ICCMSRFLKT



### Adjustable 4-Post Distribution Rack

- Adjustable depth: 27"-32"
- 19" EIA rack mount width
- 1500 lb. capacity



Adjustable depth

7' H, 45 RMS  
Anchor Kit

ICCMSR4P84  
ICCMSRFLKT



### Cable Management Rack

- 6" D x 3.15" W channels
- 19" EIA rack mount width
- 1000 lb. capacity



Cable channels






7' H, 44 RMS  
Anchor Kit

ICCMSMRH7  
ICCMSRFLKT

A black cable management rack is shown, featuring multiple horizontal slots. Each slot contains a bundle of blue cables, which are held in place by blue elastic straps. The cables are bundled together and run vertically. The rack is mounted on a light gray background.

## Cable Managers



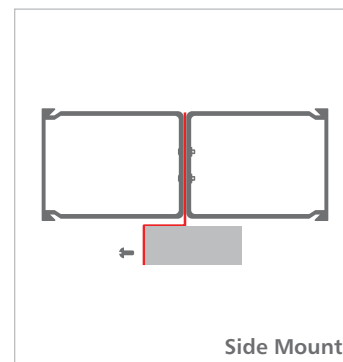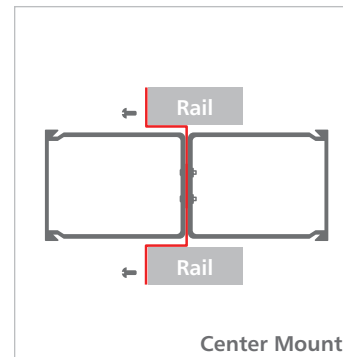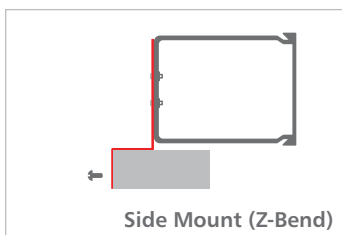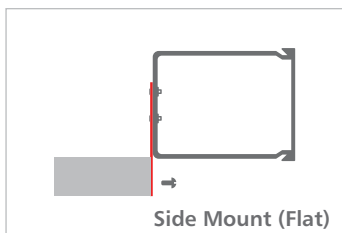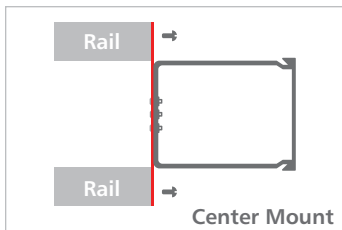

## Vertical Finger Duct Panels

### Single-sided

#### 2-Pack, Side or Center Mount, Flat Bracket

78" H x 6" W x 5" D ICCMSCMA73

#### Side Mount, Flat Bracket

78" H x 4" W x 5" D ICCMSCMA84

#### Side Mount, Z-Bend Bracket

78" H x 4" W x 5" D ICCMSCMA81

35" H x 4" W x 5" D ICCMSCMA21

### Double-sided

#### Center Mount, Z-Bend Bracket

78" H x 4" W x 10" D ICCMSCMA82

35" H x 4" W x 10" D ICCMSCMA22

#### Side Mount, Z-Bend Bracket

78" H x 4" W x 10" D ICCMSCMA83

35" H x 4" W x 10" D ICCMSCMA23



## Vertical Channels with Plastic Covers 4-Pack ValuePack

- Mount on the front, rear, and in-between racks
- Front swivel latches
- Large rear openings
- Adjustable mounting brackets swing-out left and right
- One 4-pack can build two 7-foot channels

40" H, 4-Pack

ICCMSC40BK



### Single-sided Finger Ducts, 3" Depth

- |                           |               |            |
|---------------------------|---------------|------------|
| • 24 slotted ducts        | 1 RMS, 6-Pack | ICCMSCMAC1 |
| • Flexible fingers        | 1 RMS         | ICCMSCMA41 |
| • 16 GA steel frame       | 2 RMS, 6-Pack | ICCMSCMAC2 |
| • Includes slide-on cover | 2 RMS         | ICCMSCMA42 |



### Single-sided Finger Ducts, 5" Depth

- |                           |       |            |
|---------------------------|-------|------------|
| • 24 slotted ducts        | 1 RMS | ICCMSCMA15 |
| • Flexible fingers        | 2 RMS | ICCMSCMA25 |
| • 16 GA steel frame       |       |            |
| • Includes slide-on cover |       |            |



### Double-sided Finger Ducts

- |                           |               |            |
|---------------------------|---------------|------------|
| • 24 slotted ducts        | 1 RMS, 6-Pack | ICCMSCMAD1 |
| • Flexible fingers        | 1 RMS         | ICCMSCMA61 |
| • 16 GA steel frame       | 2 RMS, 6-Pack | ICCMSCMAD2 |
| • Includes slide-on cover | 2 RMS         | ICCMSCMA62 |



### Metal Blank Panels

- |                                    |                |            |
|------------------------------------|----------------|------------|
| • Fills open spaces between panels | 1 RMS, 12-Pack | ICCMSCMPC1 |
| • 16 GA steel frame                | 1 RMS          | ICCMSCMPB1 |
|                                    | 2 RMS, 12-Pack | ICCMSCMPC2 |
|                                    | 2 RMS          | ICCMSCMPB2 |
|                                    | 3 RMS, 6-Pack  | ICCMSCMPC3 |
|                                    | 3 RMS          | ICCMSCMPB3 |
|                                    | 4 RMS, 6-Pack  | ICCMSCMPC4 |
|                                    | 4 RMS          | ICCMSCMPB4 |



### Plastic Interbay Rings

- |                          |               |            |
|--------------------------|---------------|------------|
| • Five plastic rings     | 1 RMS, 6-Pack | ICCMSCMAV1 |
| • Rear cable openings    | 1 RMS         | ICCMSCMA51 |
| • 16 GA steel frame      | 2 RMS, 6-Pack | ICCMSCMAV2 |
| • Includes snap-on cover | 2 RMS         | ICCMSCMA52 |



### Extended Bracket 6-Pack ValuePack

- |                                  |             |            |
|----------------------------------|-------------|------------|
| • Front or rear cable management | Front, 3" D | ICCMSFCMC3 |
| • No extra RMS needed            | Rear, 5" D  | ICCMSRCMC5 |
| • 16 GA steel frame              |             |            |



### Metal Vertical Rings

- |                                |               |            |
|--------------------------------|---------------|------------|
| • Five centered vertical rings | 1 RMS, 6-Pack | ICCMSCMP61 |
| • Horizontal management        | 1 RMS         | ICCMSCMPK1 |
| • 16 GA steel frame            | 2 RMS, 6-Pack | ICCMSCMP62 |
| • Includes steel snap-on cover | 2 RMS         | ICCMSCMPK2 |



### Metal Vertical and Horizontal Rings

- |                                                                 |       |            |
|-----------------------------------------------------------------|-------|------------|
| • Three centered vertical rings with two outer horizontal rings | 1 RMS | ICCMSCMP31 |
| • Horizontal & vertical management                              | 2 RMS | ICCMSCMP32 |
| • 16 GA steel frame                                             |       |            |
| • Includes steel snap-on cover                                  |       |            |





Wall mount



Ceiling mount



Batwing



Batwing clip

### J-Hooks 25-Pack ValuePacks

- Galvanized steel with a rust resistant zinc finish

#### Wall Mount

|           |            |
|-----------|------------|
| 3/4" D    | ICCMSJHK22 |
| 1 5/16" D | ICCMSJHK33 |
| 2" D      | ICCMSJHK44 |
| 4" D      | ICCMSJHK55 |

#### Ceiling Mount

|           |            |
|-----------|------------|
| 3/4" D    | ICCMSJH922 |
| 1 5/16" D | ICCMSJH933 |
| 2" D      | ICCMSJH944 |
| 4" D      | ICCMSJH955 |

#### Batwing

|           |            |
|-----------|------------|
| 3/4" D    | ICCMSJHW22 |
| 1 5/16" D | ICCMSJHW33 |
| 2" D      | ICCMSJHW44 |
| 4" D      | ICCMSJHW55 |



### Metal "L" Bracket

- Custom vertical or horizontal cable management
- 25-Pack ValuePack

0.95" H x 6" W

ICCMSCMPLC



### Vertical Metal Rings

- Mounts on the sides of racks
- Double-sided

3" W  
6" W

ICCMSCMPR3  
ICCMSCMPR4



### Vertical Metal Rings

- Mounts on the sides of racks
- 10-Pack ValuePack

1.70" W  
3" W

ICCMSCMPT1  
ICCMSCMPT2



### Cable Radius Manager

- Mounts on the side of brackets
- 20-Pack ValuePack

2.44" H x 3.6" W

ICCMSRMU1C



### Horizontal Plastic Ring

- Mounts on the sides of racks

10-Pack ValuePack  
Single, 1.25" H

ICCMSCMPV6  
ICCMSCMPR6



### Vertical Plastic Ring

- Mounts on the sides of racks

10-Pack ValuePack  
Single, 1.25" W

ICCMSCMPV5  
ICCMSCMPR5



### Universal Plastic Ring

- Mounts on the side or in-between two racks

10-Pack ValuePack  
Single, 3" H x 3" W

ICCMSCMPV7  
ICCMSCMPR7



### Metal Wall Mount D-Rings

- 100-Pack ValuePack

2" D  
3" D  
5" D

ICCMSDRM02  
ICCMSDRM03  
ICCMSDRM05



### Plastic Wall Mount D-Rings

- 100-Pack ValuePack

2" D  
3" D  
5" D

ICCMSDRP02  
ICCMSDRP03  
ICCMSDRP05



## Shelves







### Solid Bottom Rack Shelves

- Up to a 250 lb. capacity

#### Single-sided

|                      |            |
|----------------------|------------|
| 10" D, 2 RMS, 2-Pack | ICCMSRSFC1 |
| 10" D, 2 RMS         | ICCMSRSF10 |
| 15" D, 3 RMS, 2-Pack | ICCMSRSFC2 |
| 15" D, 3 RMS         | ICCMSRSF15 |

#### Double-sided

|                      |            |
|----------------------|------------|
| 20" D, 2 RMS, 2-Pack | ICCMSRDSC3 |
| 20" D, 2 RMS         | ICCMSRDS20 |
| 30" D, 3 RMS         | ICCMSRDS30 |
| 20" D, 3 RMS         | ICCMSHDS20 |



### Vented Bottom Rack Shelves

- Up to a 100 lb. capacity

#### Single-sided

|                      |            |
|----------------------|------------|
| 10" D, 2 RMS, 2-Pack | ICCMSRSVC1 |
| 10" D, 2 RMS         | ICCMSRSV10 |
| 15" D, 3 RMS, 2-Pack | ICCMSRSVC2 |
| 15" D, 3 RMS         | ICCMSRSV15 |

#### Double-sided

|                      |            |
|----------------------|------------|
| 20" D, 2 RMS, 2-Pack | ICCMSRDVC4 |
| 20" D, 2 RMS         | ICCMSRDV20 |
| 30" D, 3 RMS         | ICCMSRDV30 |



### Adjustable 4-Post Shelf

- 125 lb. capacity

27"-32" D, 2 RMS      ICCMSRAS30



### Vented 4-Post Shelf

- 125 lb. capacity

32" D, 2 RMS      ICCMSRFV32



### Keyboard Rack Shelves

- 25 lb. capacity

#### Sliding Shelf

|              |            |
|--------------|------------|
| 10" D, 3 RMS | ICCMSRKLST |
|--------------|------------|

#### Sliding Mouse Tray

|              |            |
|--------------|------------|
| 10" D, 3 RMS | ICCMSRKSMT |
|--------------|------------|





### Wall Shelf

- 125 lb. capacity


17" D, 2-Pack      ICCMSWMSV2



## Ladder Rack System

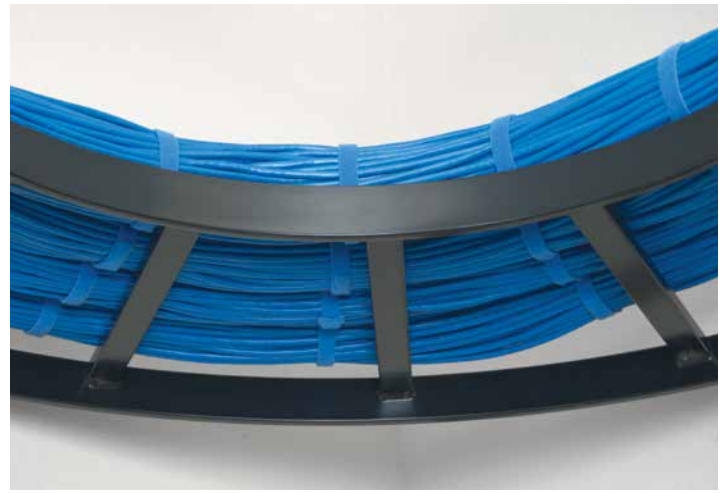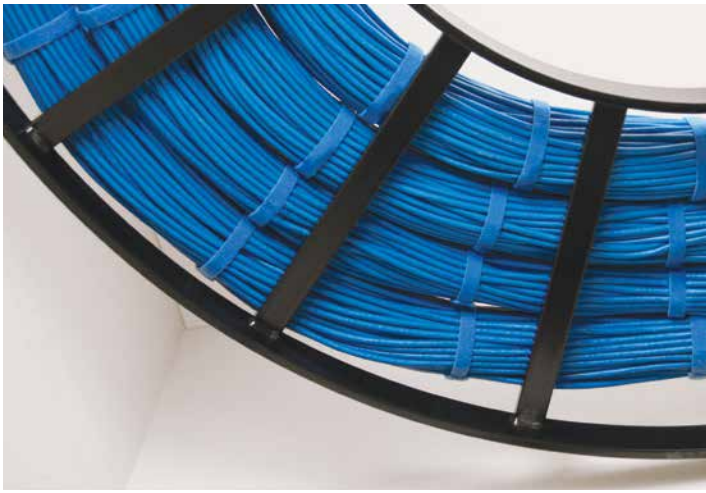


Inside Corner Turn

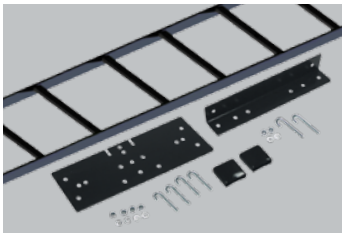


### Ladder Rack Kit

- Includes a 5' runway, relay bracket, wall angle, and J-bolts

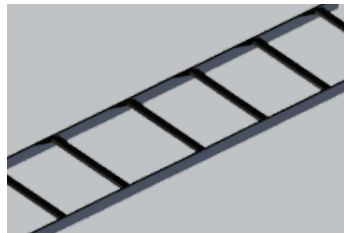


### Ladder Rack Runway

- 16 GA steel with a durable powder-coated finish

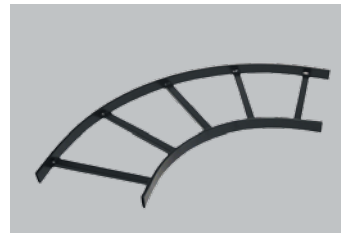

### 90° Flat Turn

- Gradual sweeping bend

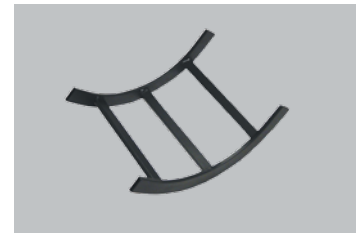

### 90° Corner Turns

- Routes cable vertically

Kit

ICCMSLRW05

7', 2-Pack ValuePack  
10'  
5'

ICCMSLSTV7  
ICCMSLST10  
ICCMSLST05


Flat Turn

ICCMSLFT90

Inside Turn  
Outside Turn

ICCMSLIR90  
ICCMSLOR90



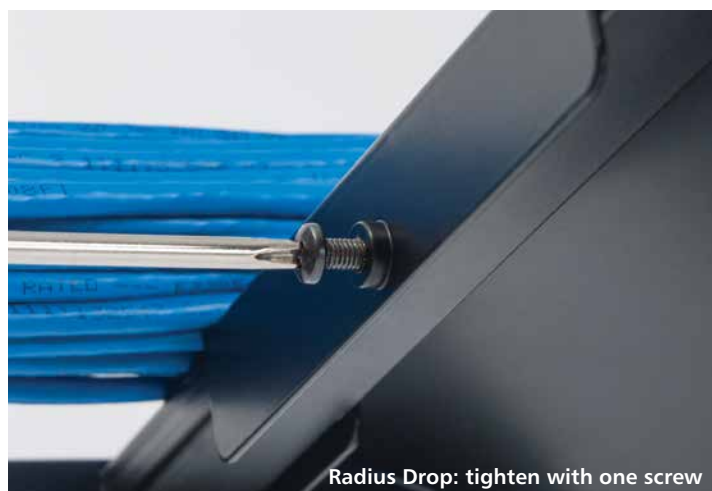

### Radius Drops

- Maintains cable's bend radius at drop points

2-Pack ValuePack


ICCMSLRADB

### Cable Retainers

- Prevents cable from falling

10-Pack ValuePack

ICCMSLRARP

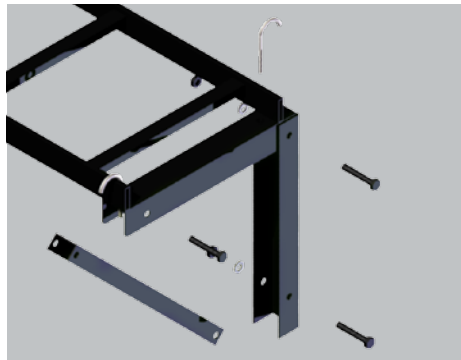

### Butt Splices

- Joins ladder rack runway at ends

10-Pack ValuePack

ICCMSLRBSK

### Triangle Wall Support

- Holds ladder rack runway to the wall, recommended every 5'

6-Pack ValuePack  
Single Support

ICCMSLTWS6  
ICCMSLTWSK

### Swivel Butt Splices

- Allows ends to adjust to various angles

2-Pack ValuePack

ICCMSLESSK




### Wall Support Angle

- Mounts runway to the wall

2-Pack ValuePack  
Single Support Angle

ICCMSLAWS2  
ICCMSLAWSK

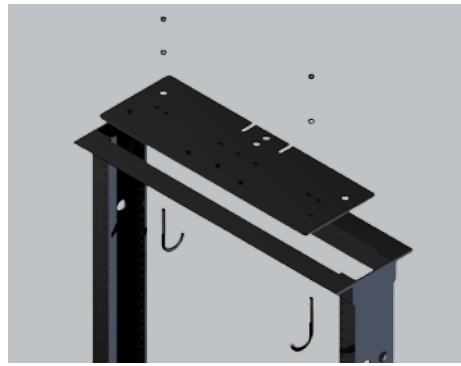

### Relay Rack Bracket

- Mounts and secures runway over 2-Post racks

Bracket

ICCMSLRBK




### 4-Post Relay Rack Brackets

- Secures runway over 4-Post racks

2-Pack ValuePack

ICCMSL4PBK

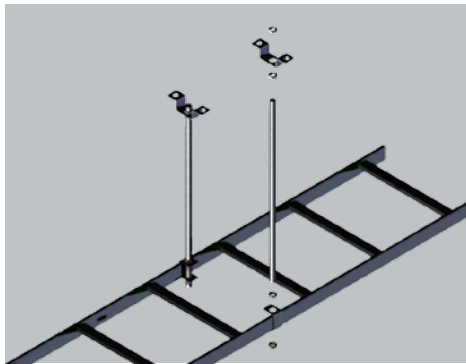


### 6' Threaded Ceiling Rods

- Ceiling mount to sustain over-hanging runway

2-Pack ValuePack

ICCMSLCMRK

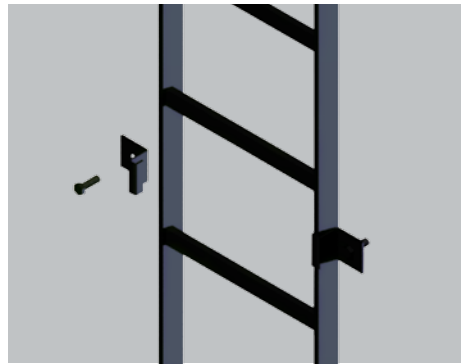


### Wall Brackets

- Secures runway sections flat against the wall

2-Pack ValuePack

ICCMSLVWBK

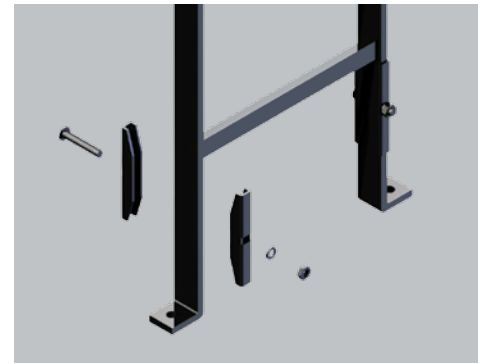


### Floor Mount Feet

- Secure runway to the floor with mounting feet and butt splices

2-Pack ValuePack  
2-Pack ValuePack

ICCMSLMFFK  
ICCMSLMFF2

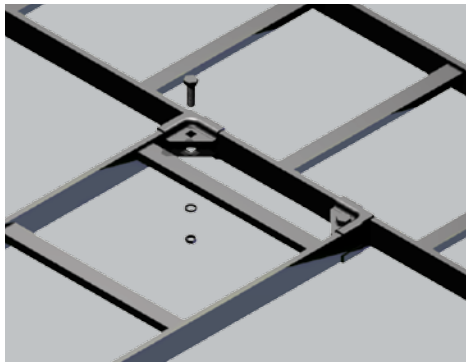

### Tee-Junction Splices

- Fastens runway in a tee intersection

2-Pack ValuePack

ICCMSLTJSK



### Protective End Caps

- Covers runway ends

2-Pack ValuePack

ICCMSLPECK



### J-Bolts

- Inserts over and secures runway

2-Pack ValuePack

ICCMSLJB01





# Residential Enclosures



## 14" Combo

- For small and single-family homes
- 20 GA steel
- UL Listed
- Designed to be stud mounted
- Also available in 21" and 28"

## 9" Combo

- For apartments and condos
- ABS plastic
- ETL Listed
- Designed to be surface or stud mounted






## 8" Combo

- For apartments and condos
- ABS plastic
- ETL Listed
- Designed to be surface or stud mounted

## Mini Combo

- For remodels and retrofits
- ABS plastic
- UL Listed
- Designed to be surface mounted



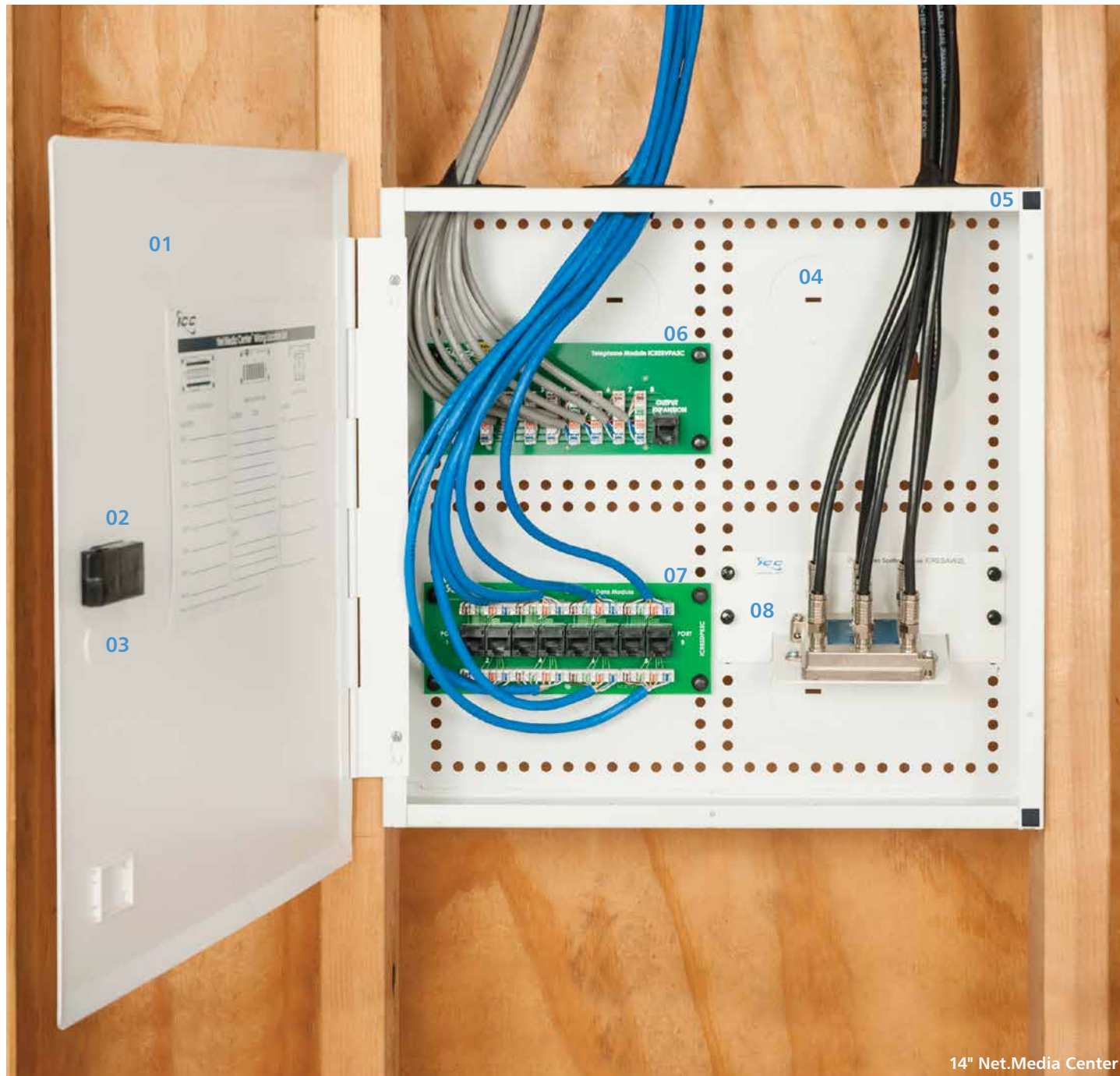

14" Net.Media Center



09



10



11



12

## 20 Gauge Steel Net.Media Center™ Combos


- For small and single-family homes
- Designed to be stud mounted
- Enclosures are compatible with most major brand modules

- 01 Hinged reversible door
- 02 Door latch
- 03 Lock knockout
- 04 2" Cable knockouts
- 05 Rubber bumpers
- 06 Voice module

- 07 CAT 6 module
- 08 Video splitter module
- 09 Rubber grommets
- 10 Stud depth measurements
- 11 AC power knockouts
- 12 Extendable mounting tabs



|     | Voice Ports | Data Ports | Video Ports | Part No.   |
|-----|-------------|------------|-------------|------------|
| 14" | 8, RJ-31x   | 8, CAT 6   | 6, 2 GHz    | ICRESDC14K |
| 14" | 8, RJ-31x   | -          | 6, 2 GHz    | ICRESDC14D |
| 14" | 6, RJ-31x   | 6, CAT 5e  | -           | ICRESDC14W |
| 21" | 8, RJ-31x   | 8, CAT 6   | 6, 2 GHz    | ICRESDC21K |
| 28" | 8, RJ-31x   | 8, CAT 6   | 6, 2 GHz    | ICRESDC28K |

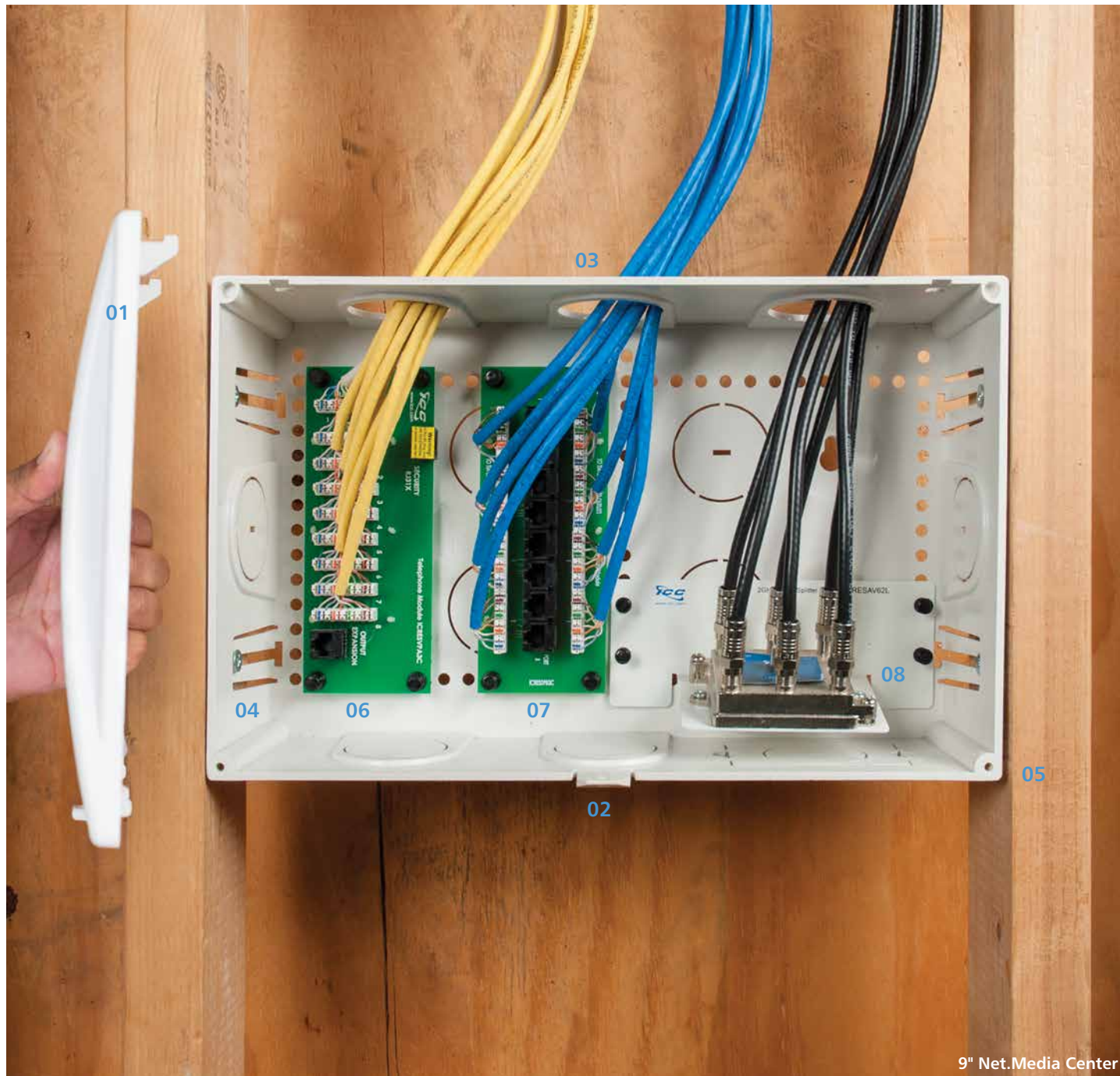



### ABS Plastic Net.Media Center™ Combos

- For apartments, condos, and remodels
- Designed to be surface or stud mounted
- 9" enclosures are compatible with most major brand modules

- 01 Cover
- 02 Pad lock hasp
- 03 Cable knockouts
- 04 Extendable mounting tabs
- 05 Screw-down cover holes
- 06 Voice module

- 07 Data module
- 08 Video splitter module
- 09 Plastic grommet
- 10 Stud depth measurements
- 11 AC power knockouts
- 12 Wiring diagram on cover



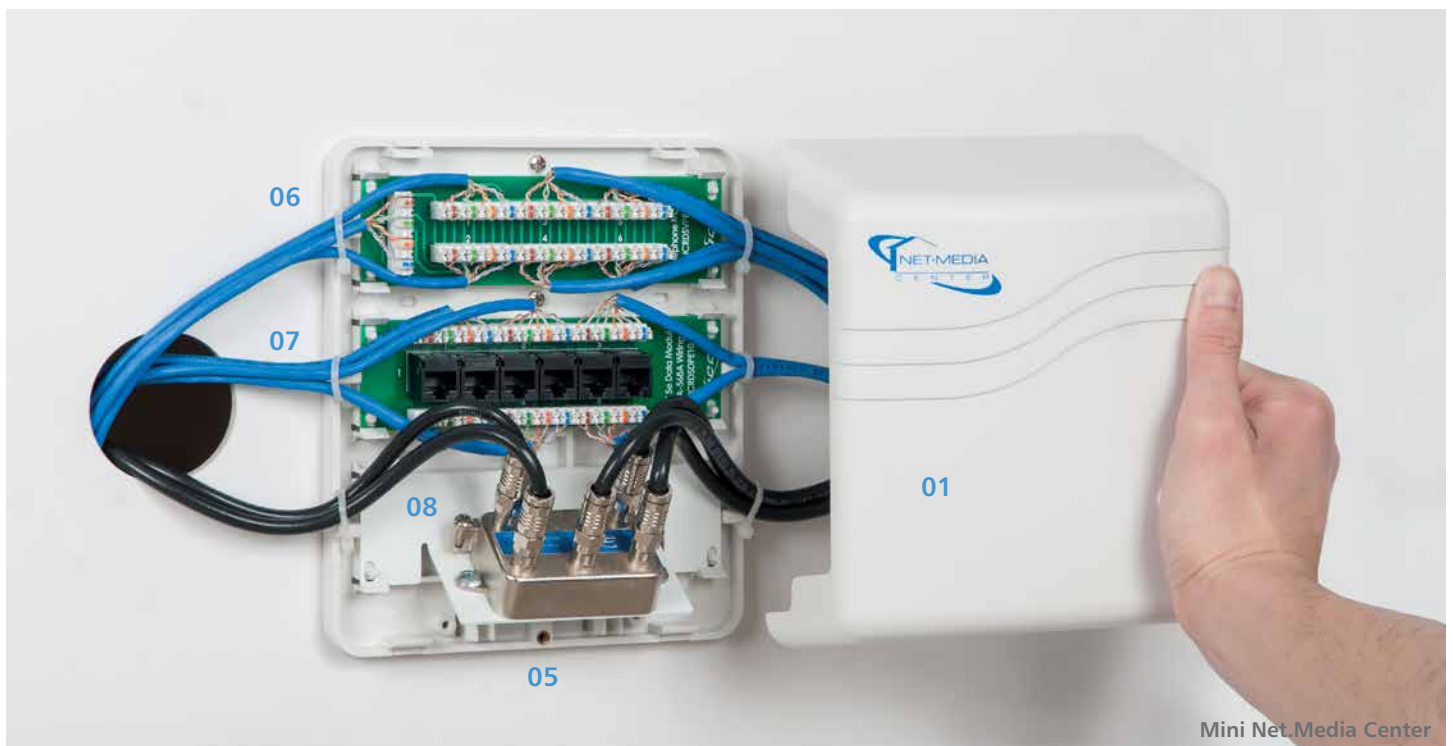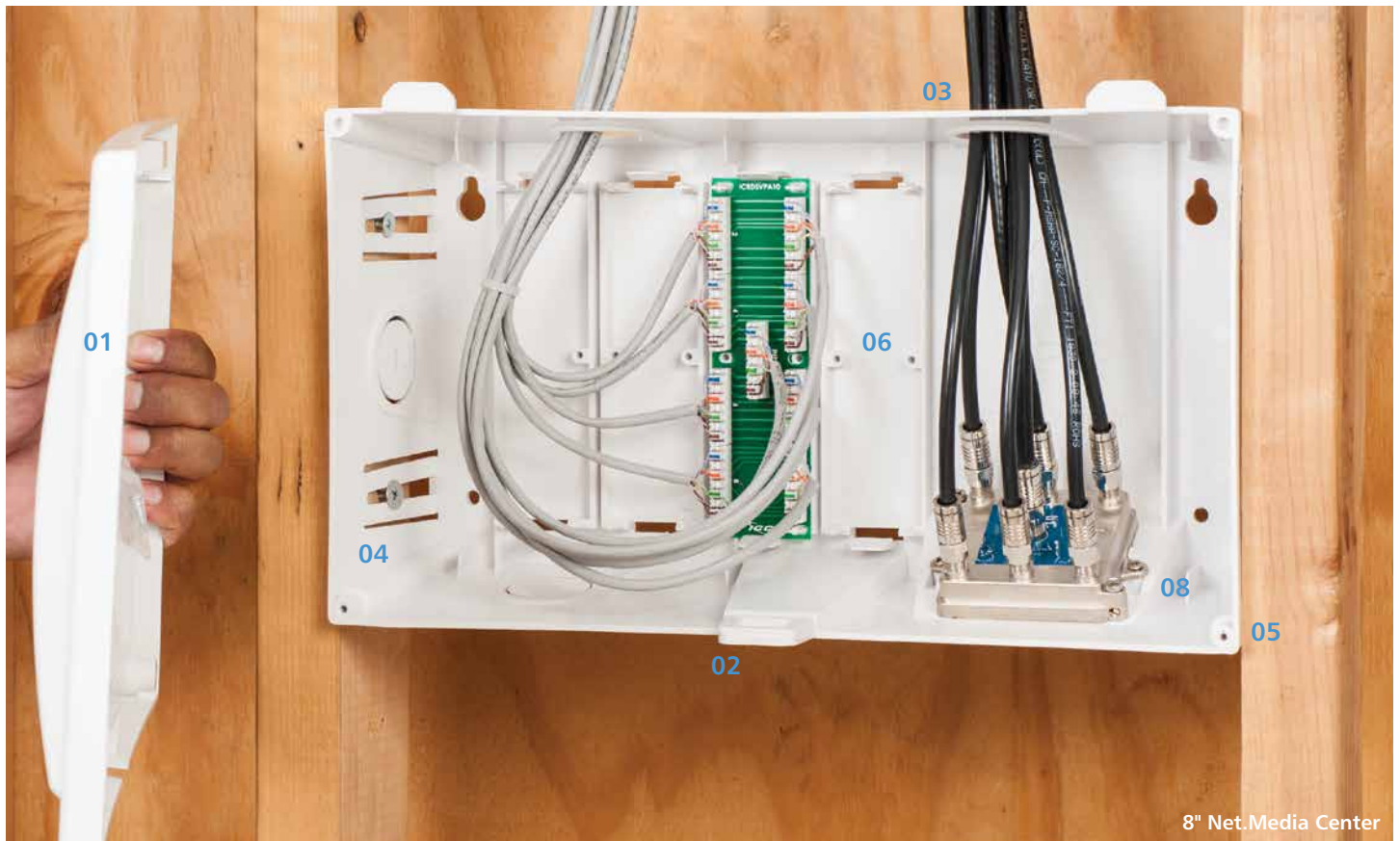

|      | Voice Ports | Data Ports | Video Ports | Part No.   |
|------|-------------|------------|-------------|------------|
| 9"   | 8, RJ-31x   | 8, CAT 6   | 6, 2 GHz    | ICRESDC9PK |
| 9"   | 8, RJ-31x   | -          | 6, 2 GHz    | ICRESDC9PD |
| 9"   | 6, RJ-31x   | 6, CAT 5e  | -           | ICRESDC9PW |
| 8"*  | 8           | -          | 6, 2 GHz    | ICRDSMMBK8 |
| 8"*  | 6           | 6, CAT 5e  | -           | ICRDSMMBW8 |
| Mini | 8           | 8, CAT 5e  | 4, 2 GHz    | ICRDSMMBK1 |
| Mini | 8           | -          | 4, 1 GHz    | ICRDSMMBD1 |
| Mini | 6           | 6, CAT 5e  | -           | ICRDSMMBW1 |

\* 8" Net.Media Centers are only available in 6-Pack ValuePack



## Voice Modules

- 8 Ports, bridged IDC
- Built-in RJ-31X and expansion ports

### Voice Modules

PCB board, 10-Pack  
PCB board  
with plastic cover  
with steel cover

ICRESVPA3D  
ICRESVPA3C  
ICRESVPA2C  
ICRESVPA1C

### Expansion Modules

PCB board  
with plastic cover  
with steel cover

ICRESVPB3C  
ICRESVPB2C  
ICRESVPB1C



## Data Modules

- 8 Ports, 110-Type IDC
- Supports up to 8 computers

### CAT 6

PCB board, 10-Pack  
PCB board  
with plastic cover  
with steel cover

ICRESDPB3D  
ICRESDPB3C  
ICRESDPB2C  
ICRESDPB1C

### CAT 5e

PCB board, 10-Pack  
PCB board  
with plastic cover  
with steel cover

ICRESDPA3D  
ICRESDPA3C  
ICRESDPA2C  
ICRESDPA1C



## Video Splitters

- Supports 2 GHz, 5~2300 MHz bandwidth
- Voice connectivity, 8-Ports, bridged IDC, supports up to 4 incoming phone lines and up to 8 extensions per line

1 x 4  
1 x 6  
1 x 6, 10-Pack  
1 x 8

ICRESAV42L  
ICRESAV62L  
ICRESAV62V  
ICRESAV82L

### Video Splitter with Voice

1 x 4  
1 x 6  
1 x 8

ICRES8V42S  
ICRES8V62S  
ICRES8V82S



## Patch Panels

- Configurable with voice, data, and video modular connectors
- Lightweight metal bracket

6 HD Ports  
4 EZ® Ports

ICRESBMP06  
ICRESBMP04



## Net.Media Center Doors

- Replacement part
- Includes two thread forming screws for mounting to enclosure

28"  
21"  
14"  
9"

ICRESDR28H  
ICRESDR21H  
ICRESDR14H  
ICRESDR9PH



## Electronics Bracket

- Designed to hold electronics such as modems, routers, and switches
- Steel bracket

Bracket

ICRESDCBUM



## Cable Management Cover

- Designed to conceal cable
- Steel construction

Cover

ICRESCMC06



## Protective Grommets

- Install in enclosure knockouts to protect cable from damage
- 10 pieces per bag

Plastic  
Rubber

ICRESDCAC3  
ICRSDCAC2




## Door Lock and Keys

- Install on 14", 21", and 28" Net.Media Center doors
- Provides added security

Lock and two keys


ICRDSDC2LK



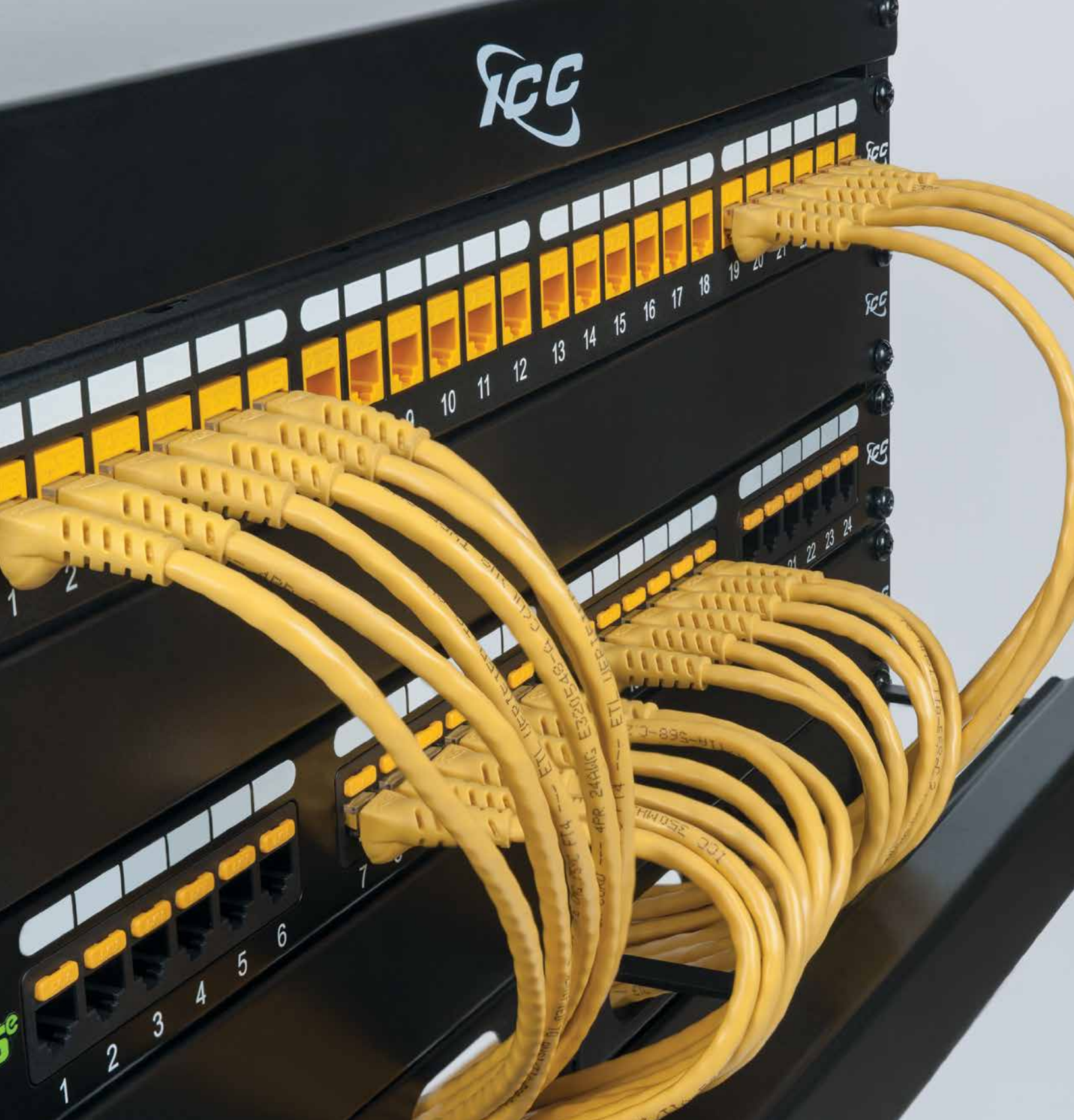

# Cords & Cable Assemblies



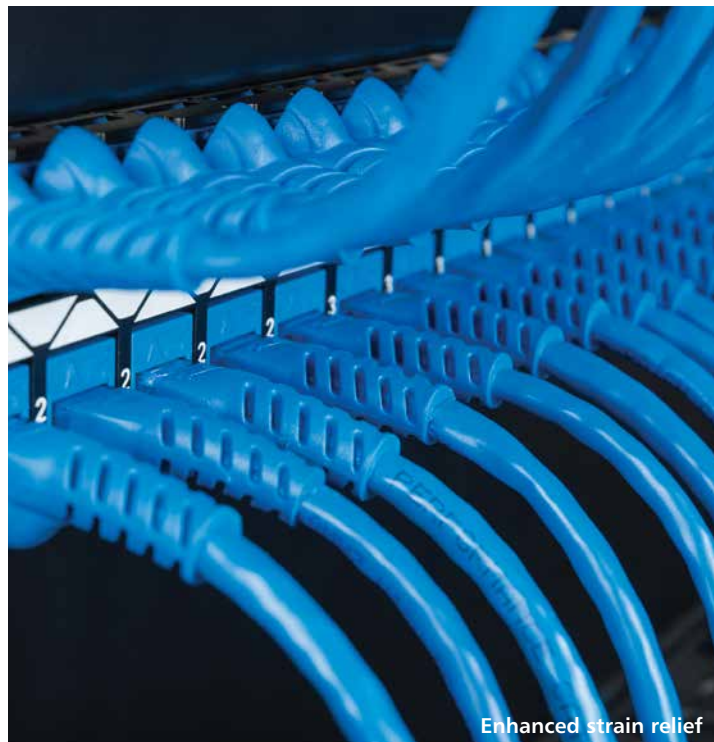

Enhanced strain relief



Snagless boot



50μ" gold plated

## Patch Cords

- Exceeds TIA-568 CAT 6A/6/5e performance standards
- Slim boot fits narrow port spacing
- Flexible snag-free strain relief boots maintain proper bend radius
- Factory tested and wired T568

### 25-Pack ValuePacks

CAT 6 ICPCSDzzBL<sup>1</sup>  
CAT 5e ICPCSCzzBL<sup>1</sup>

### Single

CAT 6A FTP 10G ICPCSGzzxx<sup>2</sup>  
CAT 6 ICPCSKzzxx<sup>3</sup>  
CAT 5e ICPCSJzzxx<sup>3</sup>

### Length (zz) & Color (xx) Options

zzBL<sup>1</sup> = 01, 03, 05, 07, 10'

zzxx<sup>2</sup> = 03, 05, 07, 10, 15, 25'

zzxx<sup>3</sup> = 01, 03, 05, 07, 10, 14, 25'



Shielded

## Modular Plugs 100-Pack ValuePack

- For customization of cords for voice or data applications
- UL Recognized

|                   | Entry | Cable          | AWG   | Part No.   |
|-------------------|-------|----------------|-------|------------|
| CAT 6             | Oval  | Solid/Stranded | 23~24 | ICMP8P8C6E |
| CAT 6/5e Shielded | Oval  | Solid/Stranded | 23~24 | ICMP8P8C6S |
| CAT 5e            | Oval  | Stranded       | 24~26 | ICMP8P8C5E |
| 8P8C              | Oval  | Solid          | 24~28 | ICMP8P8SRD |
| 8P8C              | Oval  | Stranded       | 24~28 | ICMP8P8CRD |
| 8P8C              | Flat  | Stranded       | 24~28 | ICMP8P8CFT |



Solderless joints



Terminated IDC



Male



Female

### Telco Cables

- Provides connectivity for voice and low data applications
- 25-Pair, 24 AWG, UTP, RJ-21X

|                  |                         |
|------------------|-------------------------|
| Male to Male     | ICPCSTMMzz <sup>1</sup> |
| Female to Female | ICPCSTFFzz <sup>1</sup> |
| Female to Male   | ICPCSTFMzz <sup>1</sup> |
| Male to Blunt    | ICPCSTMBzz <sup>1</sup> |
| Female to Blunt  | ICPCSTFBzz <sup>1</sup> |

Length (zz<sup>1</sup>) = 05, 10, 15, 25'





### VELCRO® Cable Tie Strap ValuePacks

- Individually perforated
- One-piece fastening device
- Available in black
- 0.5" W

#### Qwik Tie

1120-Pack, 8" L  
112-Pack, 8" L

ICACSQV8BK  
ICACSQB8BK

#### ONE-WRAP®

100-Pack, 8" L  
100-Pack, 12" L

ICACSVB8BK  
ICACSVBTBK



Strap



Tape

### VELCRO® Cable Tie Tape

- 75' L x 0.5" W
- Cut to desired length

#### Qwik Tie


10-Roll Pack, Black  
Single Roll, Black

ICACSQVKBK  
ICACSQ75BK

#### ONE-WRAP®

Single Roll, Black  
Single Roll, Blue

ICACSV75BK  
ICACSV75BL

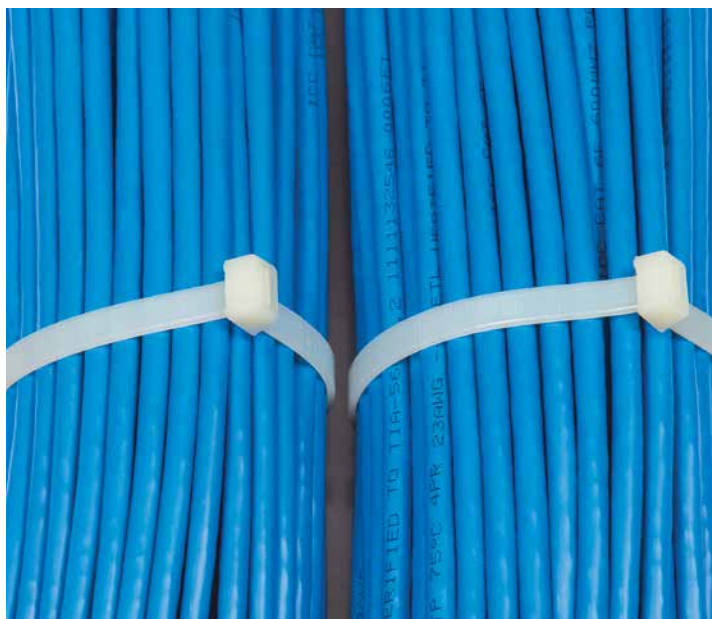

### Nylon Cable Tie ValuePacks

- One-piece construction
- Flammability rating UL 94V-2
- MIL SPEC approved

#### 100-Packs

|       | Support | Part No.    |
|-------|---------|-------------|
| 4"    | 18 lb.  | ICACSS04xx* |
| 5.5"  | 18 lb.  | ICACSS55BK  |
| 6"    | 40 lb.  | ICACSM06xx* |
| 12"   | 40 lb.  | ICACSM12xx* |
| 14.5" | 50 lb.  | ICACSL15xx* |
| 14.5" | 120 lb. | ICACSE15NL  |

#### 1000-Packs

|      | Support | Part No.    |
|------|---------|-------------|
| 7.5" | 50 lb.  | ICACSL7Kxx* |
| 8"   | 18 lb.  | ICACSS8Kxx* |
| 8.5" | 40 lb.  | ICACSM8Kxx* |
| 11"  | 50 lb.  | ICACSL1Kxx* |



\*Color Options:








# Raceway & Wiring Ducts



Adhesive back



Available individually wrapped

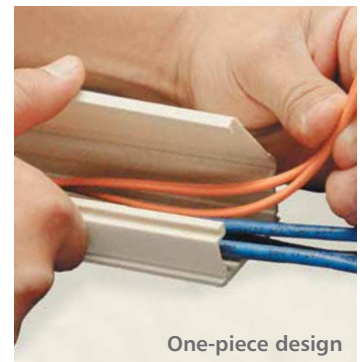

One-piece design




01



02



03

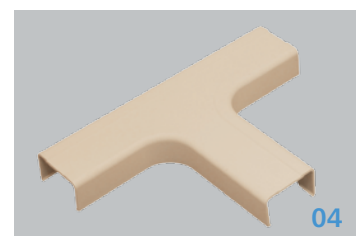

04

## 20-Pack ValuePacks

### 6' Sections (per foot)<sup>1</sup>

|                |             |
|----------------|-------------|
| 3/4" W, 1' L   | ICRWR11Sxx* |
| 1 1/4" W, 1' L | ICRWR12Sxx* |
| 1 3/4" W, 1' L | ICRWR13Sxx* |

### 8' Sections (per foot)<sup>1</sup>

|                |             |
|----------------|-------------|
| 3/4" W, 1' L   | ICRWR118xx* |
| 1 1/4" W, 1' L | ICRWR128xx* |
| 1 3/4" W, 1' L | ICRWR138xx* |

## Individual Packaging

### 6' Sections (per stick)

|                |             |
|----------------|-------------|
| 3/4" W, 6' L   | ICRW22R6xx* |
| 1 1/4" W, 6' L | ICRW33R6xx* |
| 1 3/4" W, 6' L | ICRW44R6xx* |

### 8' Sections (per stick)

|                |             |
|----------------|-------------|
| 3/4" W, 8' L   | ICRW22R8xx* |
| 1 1/4" W, 8' L | ICRW33R8xx* |
| 1 3/4" W, 8' L | ICRW44R8xx* |

<sup>1</sup>Cost is calculated per foot

## Outside Corner Covers

### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11OCxx* |
| 1 1/4" | ICRW12OCxx* |
| 1 3/4" | ICRW13OCxx* |

## Covers and Bases

### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11OBxx* |
| 1 1/4" | ICRW12OBxx* |
| 1 3/4" | ICRW13OBxx* |

## Inside Corner Covers

### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11ICxx* |
| 1 1/4" | ICRW12ICxx* |
| 1 3/4" | ICRW13ICxx* |

### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22NCxx* |
| 1 1/4" | ICRW33NCxx* |
| 1 3/4" | ICRW44NCxx* |

## Tees

### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11TOxx* |
| 1 1/4" | ICRW12TOxx* |
| 1 3/4" | ICRW13TOxx* |

### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22TExx* |
| 1 1/4" | ICRW33TExx* |
| 1 3/4" | ICRW44TExx* |

\*Color Options:








Retail ready packaging



Three widths

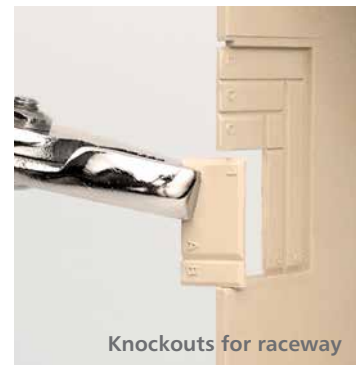


Knockouts for raceway

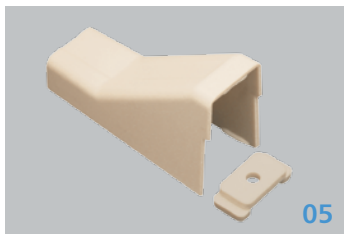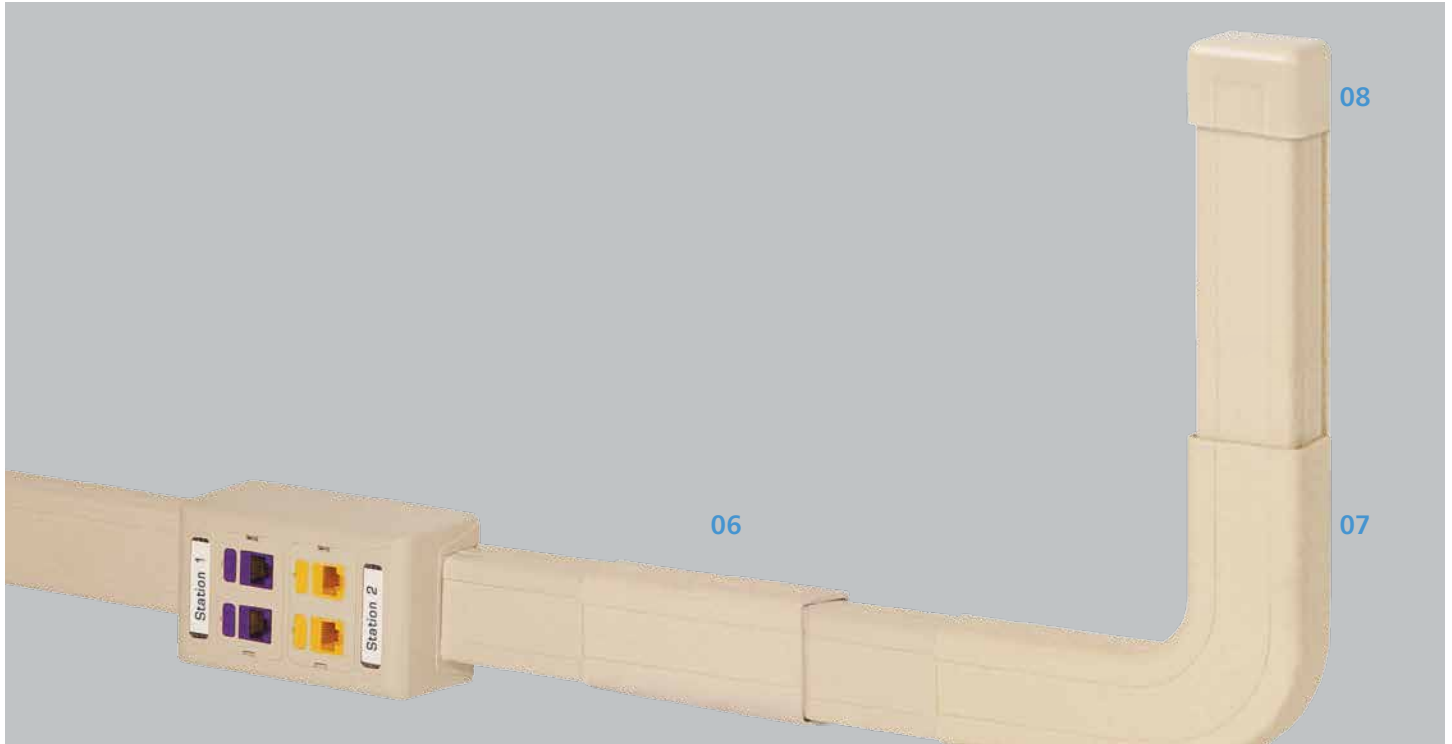


05



06

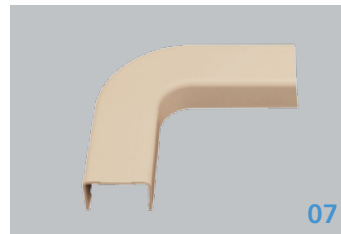

07

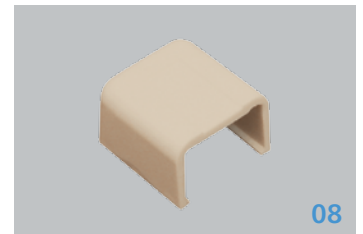

08

### Ceiling Entries

#### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11CExx* |
| 1 1/4" | ICRW12CExx* |
| 1 3/4" | ICRW13CExx* |

#### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22CMxx* |
| 1 1/4" | ICRW33CMxx* |
| 1 3/4" | ICRW44CMxx* |

### Joint Covers

#### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11JCxx* |
| 1 1/4" | ICRW12JCxx* |
| 1 3/4" | ICRW13JCxx* |

#### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22JCxx* |
| 1 1/4" | ICRW33JCxx* |
| 1 3/4" | ICRW44JCxx* |

### 90° Flat Elbows

#### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11EOxx* |
| 1 1/4" | ICRW12EOxx* |
| 1 3/4" | ICRW13EOxx* |

#### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22FExx* |
| 1 1/4" | ICRW33FExx* |
| 1 3/4" | ICRW44FExx* |

### 90° Flat Elbows and Bases

#### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11EBxx* |
| 1 1/4" | ICRW12EBxx* |
| 1 3/4" | ICRW13EBxx* |

#### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22EBxx* |
| 1 1/4" | ICRW33EBxx* |
| 1 3/4" | ICRW44EBxx* |

### End Caps

#### 10-Pack ValuePacks

|        |             |
|--------|-------------|
| 3/4"   | ICRW11ECxx* |
| 1 1/4" | ICRW12ECxx* |
| 1 3/4" | ICRW13ECxx* |




#### Single

|        |             |
|--------|-------------|
| 3/4"   | ICRW22ECxx* |
| 1 1/4" | ICRW33ECxx* |
| 1 3/4" | ICRW44ECxx* |

\*Color Options:





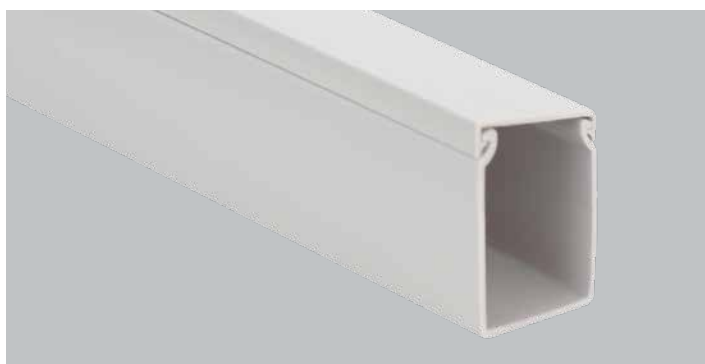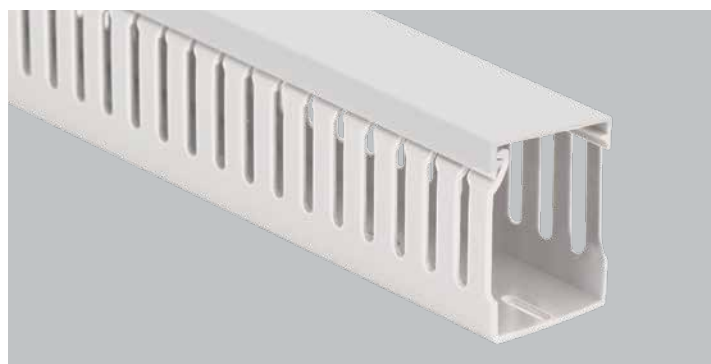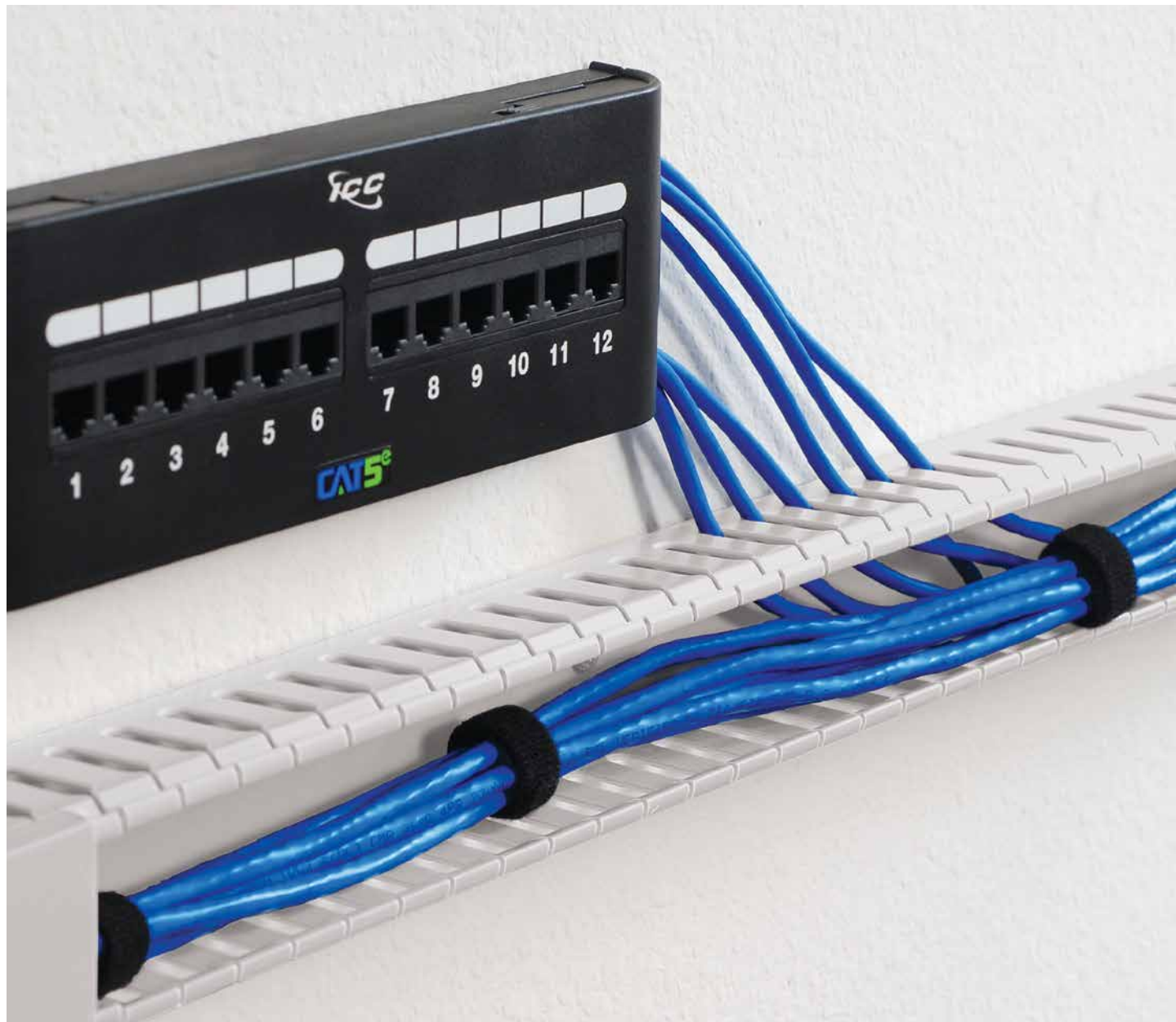

### Wiring Ducts

- 2" W x 2" H
- Includes slide-on cover
- Cut, trim, and paint to fit any décor and application layout
- Pre-drilled mount holes

Slotted  
Solid

ICRWL226xx\*  
ICRWS226WH

\*Color Options:





# Tools & Accessories



HD



EZ



Switchable blades



Replacement blades



Blade storage

### JackEasy™ Tool

- Cuts four pairs of wires
- Terminates with one squeeze
- 16 GA steel framework
- Works with HD and EZ® connectors

Tool

ICACSPDTEH

Replacement blades

ICACS8WUEH





110 termination



66 termination



Blade storage


### 110 and 66 Single Blade Punch-Down Tool

- High and low impact settings
- Includes 110 and 66 blades

Tool ICACSPDT00

#### Replacement blades

110 blade ICACS110RB  
66 blade ICACS066RB

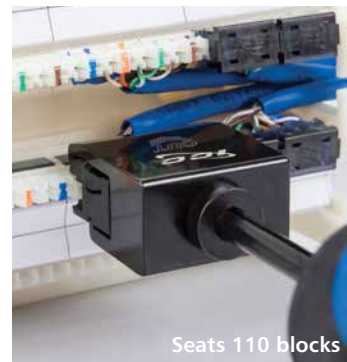

Seats 110 blocks



Replacement blade



Anti-slip grip

### 110 4-Pair Punch-Down Tool

- Cuts four pairs of wires
- 50 kgs impact force
- Anti-slip rubber grip

Tool ICACSPDT4P

Replacement blade ICACS04PH5



### Heavy Duty Modular Plug Crimping Tool

- Crimp 8-Position 8-Conductor modular plugs
- Ergonomic design provides a firm and comfortable grip

Tool

ICACSCT845




### Universal Modular Plug Crimping Tool

- Crimp 4, 6, and 8-Position modular plugs

Tool

ICACSCT864

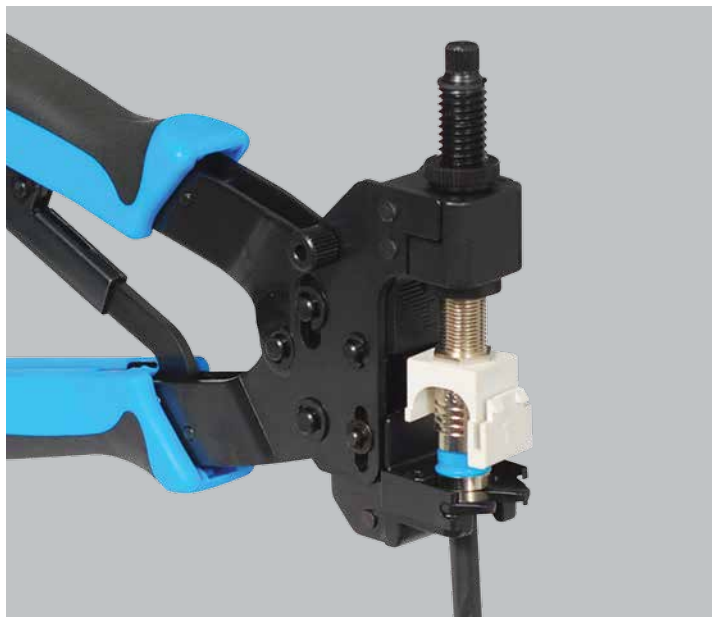

### Universal Compression Tool

- Compress F-Type, RCA, BNC, and BNC 90° compression connectors and modular compression connectors
- Ergonomic design provides a firm and comfortable grip

Tool

ICACSCT01U

#### F-Type Connectors 100-Packs

RG-6, compression ICRDSAV01C  
RG-6Q, compression ICRDSAV04C  
RG-59, compression ICRDSAV59C

#### F-Type Modular Connectors

RG-6Q, compression IC107FQGWH



### Economy Compression Tool


- Compress F-Type, RCA and BNC compression connectors

Tool

ICACSCT01E

#### F-Type Connectors 100-Packs

RG-6, compression ICRDSAV01C  
RG-6Q, compression ICRDSAV04C  
RG-59, compression ICRDSAV59C


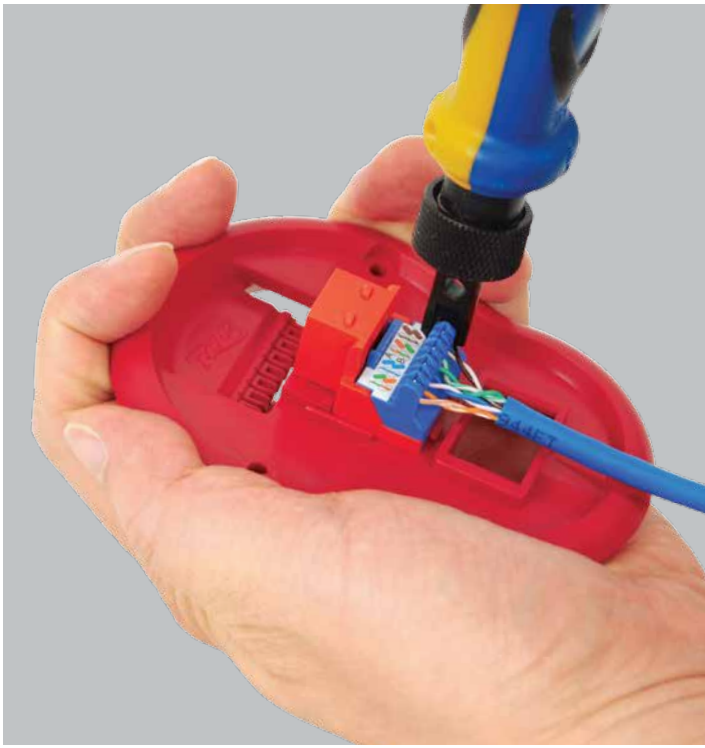


### Handheld Termination Aid

- Works with HD and EZ modules
- Provides a base for termination

Aid

ICACSHTA01

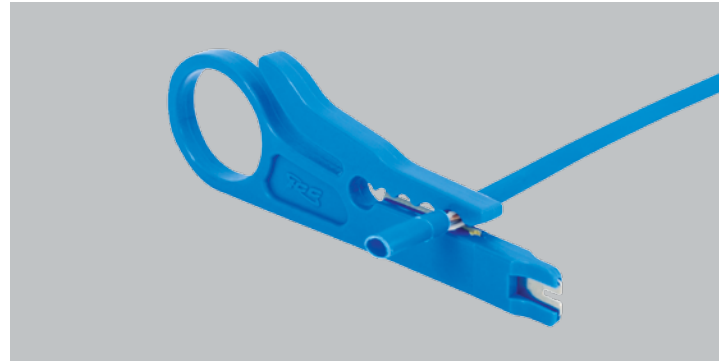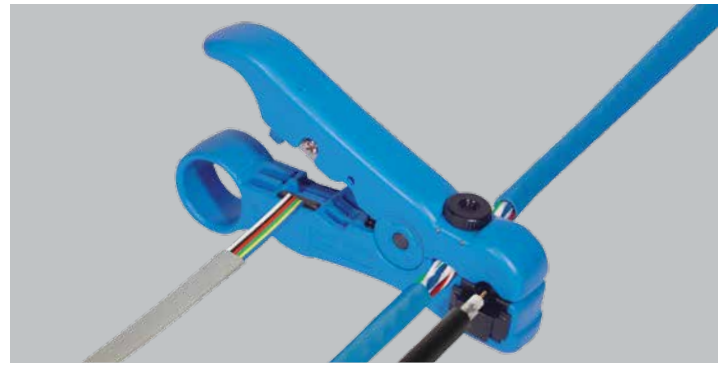

### Stripper Tools

- Deluxe: UTP, STP, and coax cable
- Economy: UTP cable
- 5~6.2mm cable diameter

Deluxe  
Economy

ICACSTSUCD  
ICACSTSUS1




### Wire Cutter and Stripper

- Strips 12~24 AWG stranded wire and 10~22 AWG solid wire

Tool

ICACSCTRST

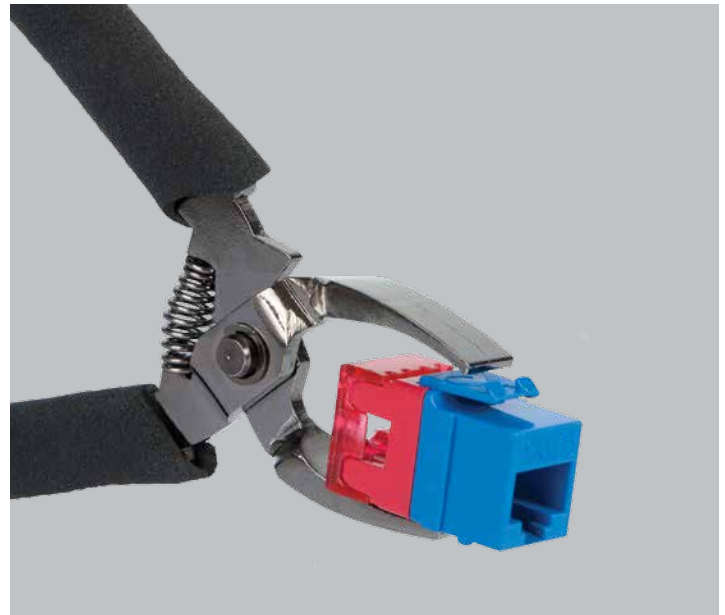

### Connector Removal Tool

- Removes modular keystone connectors in tight spaces
- Narrow profile head

Tool

ICACSPP481



# Part Number Index

|                 |        |
|-----------------|--------|
| IC066BRCLP..... | 34     |
| IC066CV050..... | 34     |
| IC066DFT50..... | 34     |
| IC066NB050..... | 34     |
| IC066NBC50..... | 34     |
| IC066SFT25..... | 34     |
| IC106FP2xx..... | 21     |
| IC107AHMWH..... | 13     |
| IC107AS4VH..... | 21     |
| IC107AUSWH..... | 15     |
| IC107B3Gxx..... | 15     |
| IC107B5Fxx..... | 15     |
| IC107B5Gxx..... | 15     |
| IC107B8GWH..... | 14     |
| IC107B9Fxx..... | 15     |
| IC107B9Gxx..... | 15     |
| IC107BC1xx..... | 22     |
| IC107BC2xx..... | 22     |
| IC107BE241..... | 28     |
| IC107BFCWH..... | 15     |
| IC107BFDWH..... | 15     |
| IC107BFGWH..... | 14     |
| IC107BGCWH..... | 15     |
| IC107BGDWH..... | 15     |
| IC107BN0xx..... | 11     |
| IC107BN2xx..... | 11     |
| IC107BNCxx..... | 15     |
| IC107BNVxx..... | 11     |
| IC107BP8VB..... | 32     |
| IC107BP12V..... | 32     |
| IC107BP241..... | 28     |
| IC107BP481..... | 28     |
| IC107BP482..... | 28     |
| IC107C5CBK..... | 10     |
| IC107C5Exx..... | 10     |
| IC107C6Axx..... | 10     |
| IC107C6CBK..... | 10     |
| IC107C6Rxx..... | 10     |
| IC107C6Sxx..... | 10     |
| IC107CP6xx..... | 10     |
| IC107DA1xx..... | 21     |
| IC107DA2xx..... | 21     |
| IC107DA4xx..... | 21     |
| IC107DDHxx..... | 13, 16 |
| IC107DFD5S..... | 17     |
| IC107DFDxx..... | 17     |
| IC107DFQWH..... | 17     |
| IC107DFS5S..... | 17     |
| IC107DFSxx..... | 17     |
| IC107DFTWH..... | 17     |
| IC107DH2xx..... | 13, 16 |
| IC107DI1xx..... | 17     |
| IC107DI2xx..... | 17     |
| IC107DI3xx..... | 17     |
| IC107DI4xx..... | 17     |
| IC107DI6xx..... | 17     |
| IC107DPIxx..... | 21     |
| IC107DR2xx..... | 16     |
| IC107DR4xx..... | 16     |
| IC107DSBxx..... | 14     |
| IC107DSCxx..... | 14     |

|                 |        |
|-----------------|--------|
| IC107E5Cxx..... | 07     |
| IC107E5Vxx..... | 07     |
| IC107F1Cxx..... | 18     |
| IC107F01xx..... | 18     |
| IC107F2Cxx..... | 18     |
| IC107F02xx..... | 18     |
| IC107F3Cxx..... | 18     |
| IC107F03xx..... | 18     |
| IC107F4Cxx..... | 18     |
| IC107F04xx..... | 18     |
| IC107F5Cxx..... | 03     |
| IC107F5Vxx..... | 03     |
| IC107F6Cxx..... | 03     |
| IC107F6Vxx..... | 03     |
| IC107F06xx..... | 18     |
| IC107F12xx..... | 18     |
| IC107FD8xx..... | 18     |
| IC107FFWSS..... | 20     |
| IC107FFWxx..... | 20     |
| IC107FM3xx..... | 20     |
| IC107FN4xx..... | 20     |
| IC107FQGWH..... | 15, 88 |
| IC107FT4xx..... | 20     |
| IC107HDMxx..... | 13     |
| IC107L6Cxx..... | 07     |
| IC107L6Vxx..... | 07     |
| IC107LC2xx..... | 11     |
| IC107LCGxx..... | 11     |
| IC107LF1xx..... | 21     |
| IC107LF2xx..... | 21     |
| IC107LF3xx..... | 21     |
| IC107LF6xx..... | 21     |
| IC107MB6BK..... | 24     |
| IC107MRDxx..... | 24     |
| IC107MRSxx..... | 24     |
| IC107PMGWH..... | 14     |
| IC107PPS6A..... | 29     |
| IC107PPU6A..... | 29     |
| IC107RG6WH..... | 14     |
| IC107R8GWH..... | 14     |
| IC107RR5WH..... | 14     |
| IC107S01SS..... | 20     |
| IC107S01xx..... | 20     |
| IC107S02SS..... | 20     |
| IC107S02xx..... | 20     |
| IC107S03SS..... | 20     |
| IC107S03xx..... | 20     |
| IC107S04SS..... | 20     |
| IC107S04xx..... | 20     |
| IC107S06SS..... | 20     |
| IC107S06xx..... | 20     |
| IC107SACWH..... | 14     |
| IC107SAPxx..... | 14     |
| IC107SB1xx..... | 22     |
| IC107SB2xx..... | 22     |
| IC107SB4WH..... | 22     |
| IC107SB6WH..... | 22     |
| IC107SBTxx..... | 22     |
| IC107SC2xx..... | 11     |
| IC107SF1SS..... | 20     |
| IC107SF2SS..... | 20     |
| IC107SF3SS..... | 20     |
| IC107SF4SS..... | 20     |
| IC107SF6SS..... | 20     |
| IC107ST2xx..... | 11     |
| IC107UAAWH..... | 15     |
| IC107UABWH..... | 15     |
| IC108SB1xx..... | 23     |
| IC108SB2xx..... | 23     |
| IC108SB4xx..... | 23     |
| IC108SB6xx..... | 23     |
| IC110CB4PC..... | 33     |
| IC110CB5PC..... | 33     |
| IC110CMBNF..... | 33     |

|                 |    |
|-----------------|----|
| IC110CMBWF..... | 33 |
| IC110H1004..... | 33 |
| IC110HLDR.....  | 33 |
| IC110NF100..... | 33 |
| IC110PRK61..... | 33 |
| IC110RM100..... | 33 |
| IC110RM200..... | 33 |
| IC110RMCMB..... | 33 |
| IC110TC450..... | 33 |
| IC110W1004..... | 33 |
| IC110W3004..... | 33 |
| IC110WF100..... | 33 |
| IC110WF300..... | 33 |
| IC110WH100..... | 33 |
| IC110WK966..... | 33 |
| IC625S51xx..... | 23 |
| IC625S52xx..... | 23 |
| IC625SB8IV..... | 24 |
| IC625SV1IV..... | 23 |
| IC625SV2IV..... | 23 |
| IC630DA6SS..... | 21 |
| IC630DB6xx..... | 21 |
| IC630DIBxx..... | 17 |
| IC630DSFxx..... | 16 |
| IC630E6GWH..... | 21 |
| IC630E60xx..... | 21 |
| IC630E66xx..... | 21 |
| IC630EB0xx..... | 18 |
| IC630EBDX.....  | 18 |
| IC630EBSSS..... | 20 |
| IC630EG0xx..... | 21 |
| IC630EGGxx..... | 21 |
| IC635DS4xx..... | 24 |
| IC635DS8xx..... | 24 |
| IC640BDSxx..... | 21 |
| IC640BSSxx..... | 21 |
| IC1074PIxx..... | 21 |
| IC1076F0xx..... | 03 |
| IC1076FCxx..... | 03 |
| IC1076FVWH..... | 03 |
| IC1076V0xx..... | 07 |
| IC1076VCxx..... | 07 |
| IC1076VWWH..... | 07 |
| IC1078E5xx..... | 07 |
| IC1078F5xx..... | 03 |
| IC1078F6xx..... | 03 |
| IC1078GAxx..... | 03 |
| IC1078L6xx..... | 07 |
| IC1078S6A0..... | 03 |
| IC06626P4C..... | 34 |
| IC06628P8C..... | 34 |
| IC06686P6C..... | 34 |
| ICACS04PH5..... | 87 |
| ICACS8WUEH..... | 86 |
| ICACS066RB..... | 87 |
| ICACS110RB..... | 87 |
| ICACSCT01E..... | 88 |
| ICACSCT01U..... | 88 |
| ICACSCT845..... | 88 |
| ICACSCT864..... | 88 |
| ICACSCTRST..... | 89 |
| ICACSDCICL..... | 31 |
| ICACSDCVCL..... | 31 |
| ICACSE15NL..... | 80 |
| ICACSGK6AS..... | 29 |
| ICACSGKS00..... | 29 |
| ICACSHA01.....  | 89 |
| ICACSL1Kxx..... | 80 |
| ICACSL7Kxx..... | 80 |
| ICACSL15xx..... | 80 |
| ICACSM06xx..... | 80 |
| ICACSM8Kxx..... | 80 |
| ICACSM12xx..... | 80 |
| ICACSMBDxx..... | 24 |

|                 |       |                  |    |                  |    |
|-----------------|-------|------------------|----|------------------|----|
| ICACSMBSxx..... | 24    | ICCMSCMPK2.....  | 59 | ICCMSRDVC4.....  | 63 |
| ICACSPDT00..... | 87    | ICCMSCMPLC.....  | 61 | ICCMSRFLKT.....  | 55 |
| ICACSPDT4P..... | 87    | ICCMSCMPR3.....  | 61 | ICCMSRFV32.....  | 63 |
| ICACSPDTEH..... | 86    | ICCMSCMPR4.....  | 61 | ICCMSRKLST.....  | 63 |
| ICACSP481.....  | 89    | ICCMSCMPR5.....  | 61 | ICCMSRKSMT.....  | 63 |
| ICACSQ75BK..... | 80    | ICCMSCMPR6.....  | 61 | ICCMSRMU1C.....  | 61 |
| ICACSQB8BK..... | 80    | ICCMSCMPR7.....  | 61 | ICCMSRSF10.....  | 63 |
| ICACSQV8BK..... | 80    | ICCMSCMPT1.....  | 61 | ICCMSRSF15.....  | 63 |
| ICACSQVKBK..... | 80    | ICCMSCMPT2.....  | 61 | ICCMSRSFC1.....  | 63 |
| ICACSS01BK..... | 53-55 | ICCMSCMPV5.....  | 61 | ICCMSRSFC2.....  | 63 |
| ICACSS04xx..... | 80    | ICCMSCMPV6.....  | 61 | ICCMSRSV10.....  | 63 |
| ICACSS8Kxx..... | 80    | ICCMSCMPV7.....  | 61 | ICCMSRSV15.....  | 63 |
| ICACSS55BK..... | 80    | ICCMSCMRH7.....  | 55 | ICCMSRSVC1.....  | 63 |
| ICACSTSUCD..... | 89    | ICCMSDRM02.....  | 61 | ICCMSRSVC2.....  | 63 |
| ICACSTSUS1..... | 89    | ICCMSDRM03.....  | 61 | ICCMSSSFR12..... | 54 |
| ICACSV75BK..... | 80    | ICCMSDRM05.....  | 61 | ICCMSSSFR25..... | 54 |
| ICACSV75BL..... | 80    | ICCMSDRP02.....  | 61 | ICCMSVHB06.....  | 53 |
| ICACSVB8BK..... | 80    | ICCMSDRP03.....  | 61 | ICCMSVHB08.....  | 53 |
| ICACSVBTBK..... | 80    | ICCMSDRP05.....  | 61 | ICCMSVHB18.....  | 53 |
| ICACSWDS10..... | 34    | ICCMSFCCMC3..... | 59 | ICCMSWMC12.....  | 54 |
| ICACSWDS20..... | 34    | ICCMSHB1RC.....  | 53 | ICCMSWMC26.....  | 54 |
| ICCABP5Exx..... | 38    | ICCMSHB1RS.....  | 53 | ICCMSWMP12.....  | 54 |
| ICCABP6Axx..... | 38    | ICCMSHB2RC.....  | 53 | ICCMSWMP26.....  | 54 |
| ICCABP6Exx..... | 38    | ICCMSHB2RS.....  | 53 | ICCMSWMR08.....  | 54 |
| ICCABP6FBL..... | 38    | ICCMSHB4RC.....  | 53 | ICCMSWMR15.....  | 54 |
| ICCABP6Vxx..... | 38    | ICCMSHB4RS.....  | 53 | ICCMSWMR30.....  | 54 |
| ICCABR5Exx..... | 38    | ICCMSHDS20.....  | 63 | ICCMSWMSV2.....  | 63 |
| ICCABR6Axx..... | 38    | ICCMSJH922.....  | 60 | ICCMSWMUR5.....  | 54 |
| ICCABR6Exx..... | 38    | ICCMSJH933.....  | 60 | ICFC12ML1G.....  | 47 |
| ICCABR6FBL..... | 38    | ICCMSJH944.....  | 60 | ICFC12ML50.....  | 47 |
| ICCABR6Vxx..... | 38    | ICCMSJH955.....  | 60 | ICFC12MLD6.....  | 47 |
| ICCMSABR62..... | 53    | ICCMSJHK22.....  | 60 | ICFC12MS1G.....  | 47 |
| ICCMSABR64..... | 53    | ICCMSJHK33.....  | 60 | ICFC12MS50.....  | 47 |
| ICCMSABR66..... | 53    | ICCMSJHK44.....  | 60 | ICFC12MSD6.....  | 47 |
| ICCMSABR68..... | 53    | ICCMSJHK55.....  | 60 | ICFC12MSP5.....  | 46 |
| ICCMSABRS2..... | 53    | ICCMSJHW22.....  | 60 | ICFC12MSP6.....  | 46 |
| ICCMSABRS4..... | 53    | ICCMSJHW33.....  | 60 | ICFC12MSPG.....  | 46 |
| ICCMSABRS6..... | 53    | ICCMSJHW44.....  | 60 | ICFC12SLD9.....  | 47 |
| ICCMSABRS8..... | 53    | ICCMSJHW55.....  | 60 | ICFC12SSD9.....  | 47 |
| ICCMS40BK.....  | 57    | ICCMSL4PBK.....  | 68 | ICFC12SSP9.....  | 46 |
| ICCMSMA15.....  | 58    | ICCMSLAWS2.....  | 68 | ICFC24ML1G.....  | 47 |
| ICCMSMA21.....  | 57    | ICCMSLAWSK.....  | 68 | ICFC24ML50.....  | 47 |
| ICCMSMA22.....  | 57    | ICCMSLCMRK.....  | 68 | ICFC24MLD6.....  | 47 |
| ICCMSMA23.....  | 57    | ICCMSLESSK.....  | 67 | ICFC24MLP5.....  | 46 |
| ICCMSMA25.....  | 58    | ICCMSLFT90.....  | 65 | ICFC24MLP6.....  | 46 |
| ICCMSMA41.....  | 58    | ICCMSLIR90.....  | 65 | ICFC24MLPG.....  | 46 |
| ICCMSMA42.....  | 58    | ICCMSLJB01.....  | 68 | ICFC24SLD9.....  | 47 |
| ICCMSMA51.....  | 59    | ICCMSLMFF2.....  | 68 | ICFC24SLP9.....  | 46 |
| ICCMSMA52.....  | 59    | ICCMSLMFFK.....  | 68 | ICFODE41WM.....  | 43 |
| ICCMSMA61.....  | 58    | ICCMSLOR90.....  | 65 | ICFOJ1G7zz.....  | 48 |
| ICCMSMA62.....  | 58    | ICCMSLPECK.....  | 68 | ICFOJ1M3zz.....  | 48 |
| ICCMSMA81.....  | 57    | ICCMSLRBSK.....  | 67 | ICFOJ1M5zz.....  | 48 |
| ICCMSMA82.....  | 57    | ICCMSLRCRP.....  | 66 | ICFOJ1M7zz.....  | 48 |
| ICCMSMA83.....  | 57    | ICCMSLRRBK.....  | 68 | ICFOJ2G7zz.....  | 48 |
| ICCMSMA84.....  | 57    | ICCMSLRRDB.....  | 66 | ICFOJ2M3zz.....  | 48 |
| ICCMSMAC1.....  | 58    | ICCMSLRW05.....  | 65 | ICFOJ2M5zz.....  | 48 |
| ICCMSMAC2.....  | 58    | ICCMSLST05.....  | 65 | ICFOJ2M7zz.....  | 48 |
| ICCMSMAD1.....  | 58    | ICCMSLST10.....  | 65 | ICFOJ3M3zz.....  | 48 |
| ICCMSMAD2.....  | 58    | ICCMSLSTV7.....  | 65 | ICFOJ3M5zz.....  | 48 |
| ICCMSMAV1.....  | 59    | ICCMSLTJSK.....  | 68 | ICFOJ3M7zz.....  | 48 |
| ICCMSMAV2.....  | 59    | ICCMSLTWS6.....  | 67 | ICFOJ7C3zz.....  | 48 |
| ICCMSCMP31..... | 59    | ICCMSLTWSK.....  | 67 | ICFOJ7C5zz.....  | 48 |
| ICCMSCMP32..... | 59    | ICCMSLVWBK.....  | 68 | ICFOJ7C7zz.....  | 48 |
| ICCMSCMP61..... | 59    | ICCMSR4P84.....  | 55 | ICFOJ8C3zz.....  | 48 |
| ICCMSCMP62..... | 59    | ICCMSR1948.....  | 55 | ICFOJ8C5zz.....  | 48 |
| ICCMSCMPB1..... | 58    | ICCMSR1972.....  | 55 | ICFOJ8C7zz.....  | 48 |
| ICCMSCMPB2..... | 58    | ICCMSR1984.....  | 55 | ICFOJ8G7zz.....  | 48 |
| ICCMSCMPB3..... | 58    | ICCMSRAS30.....  | 63 | ICFOJ9C3zz.....  | 48 |
| ICCMSCMPB4..... | 58    | ICCMSRCMC5.....  | 59 | ICFOJ9C5zz.....  | 48 |
| ICCMSCMPC1..... | 58    | ICCMSRDS20.....  | 63 | ICFOJ9C7zz.....  | 48 |
| ICCMSCMPC2..... | 58    | ICCMSRDS30.....  | 63 | ICFOJATGzz.....  | 48 |
| ICCMSCMPC3..... | 58    | ICCMSRDS33.....  | 63 | ICFOJATMzz.....  | 48 |
| ICCMSCMPC4..... | 58    | ICCMSRDV20.....  | 63 | ICFOJATNzz.....  | 48 |
| ICCMSCMPK1..... | 59    | ICCMSRDV30.....  | 63 | ICFOJATSzz.....  | 48 |

|                 |    |                 |    |                 |    |
|-----------------|----|-----------------|----|-----------------|----|
| ICFOPB00BK..... | 45 | ICMPPMB606..... | 24 | ICRW11Cxx.....  | 82 |
| ICFOPC16BK..... | 45 | ICMPPTF242..... | 30 | ICRW11JCxx..... | 83 |
| ICFOPC26BK..... | 45 | ICMPPTF244..... | 30 | ICRW11OBxx..... | 82 |
| ICFOPC161G..... | 45 | ICPCSCzzBL..... | 78 | ICRW11OCxx..... | 82 |
| ICFOPL16B5..... | 45 | ICPCSDzzBL..... | 78 | ICRW11TOxx..... | 82 |
| ICFOPL16BG..... | 45 | ICPCSGzzxx..... | 78 | ICRW12CExx..... | 83 |
| ICFOPL16BK..... | 45 | ICPCSJzzxx..... | 78 | ICRW12EBxx..... | 83 |
| ICFOPL161G..... | 45 | ICPCSKzzxx..... | 78 | ICRW12ECxx..... | 83 |
| ICFOPL1615..... | 45 | ICPCSTFBzz..... | 79 | ICRW12EOxx..... | 83 |
| ICFOPL1619..... | 45 | ICPCSTFFzz..... | 79 | ICRW12ICxx..... | 82 |
| ICFOPS16BK..... | 45 | ICPCSTFMzz..... | 79 | ICRW12JCxx..... | 83 |
| ICFOPS26BK..... | 45 | ICPCSTMBzz..... | 79 | ICRW12OBxx..... | 82 |
| ICFOPT16BK..... | 45 | ICPCSTMMzz..... | 79 | ICRW12OCxx..... | 82 |
| ICFOPT26BK..... | 45 | ICRDS0F5WH..... | 19 | ICRW12TOxx..... | 82 |
| ICFORE31RM..... | 43 | ICRDS0FLWH..... | 19 | ICRW13CExx..... | 83 |
| ICFORE62RM..... | 43 | ICRDS3RFWH..... | 16 | ICRW13EBxx..... | 83 |
| ICFORECAC2..... | 43 | ICRDSAV01C..... | 88 | ICRW13ECxx..... | 83 |
| ICFORECAC3..... | 43 | ICRDSAV04C..... | 88 | ICRW13EOxx..... | 83 |
| ICFORET4RM..... | 43 | ICRDSAV59C..... | 88 | ICRW13ICxx..... | 82 |
| ICFORPP1RM..... | 44 | ICRSDC2LK.....  | 76 | ICRW13JCxx..... | 83 |
| ICFOSKFM12..... | 43 | ICRSDCAC2.....  | 76 | ICRW13OBxx..... | 82 |
| ICFP96ML1G..... | 44 | ICRDSMMBD1..... | 75 | ICRW13OCxx..... | 82 |
| ICMA267D66..... | 11 | ICRDSMMBK1..... | 75 | ICRW13TOxx..... | 82 |
| ICMA350A6C..... | 11 | ICRDSMMBK8..... | 75 | ICRW22CMxx..... | 83 |
| ICMA3508DR..... | 11 | ICRDSMMBW1..... | 75 | ICRW22EBxx..... | 83 |
| ICMAGBLOCK..... | 24 | ICRDSMMBW8..... | 75 | ICRW22ECxx..... | 83 |
| ICMB89B0WH..... | 34 | ICRDSQBpxx..... | 16 | ICRW22FExx..... | 83 |
| ICMB89BCWH..... | 34 | ICRDSVOLWH..... | 19 | ICRW22JCxx..... | 83 |
| ICMP8P8C5E..... | 78 | ICRDSV05WH..... | 19 | ICRW22NCxx..... | 82 |
| ICMP8P8C6E..... | 78 | ICRDSVF5WH..... | 19 | ICRW22R6xx..... | 82 |
| ICMP8P8C6S..... | 78 | ICRDSVFLWH..... | 19 | ICRW22R8xx..... | 82 |
| ICMP8P8CFT..... | 78 | ICRES8V42S..... | 76 | ICRW22TExx..... | 82 |
| ICMP8P8CRD..... | 78 | ICRES8V62S..... | 76 | ICRW33CMxx..... | 83 |
| ICMP8P8SRD..... | 78 | ICRES8V82S..... | 76 | ICRW33EBxx..... | 83 |
| ICMPP12F5E..... | 32 | ICRESAV42L..... | 76 | ICRW33ECxx..... | 83 |
| ICMPP12F6E..... | 32 | ICRESAV62L..... | 76 | ICRW33FExx..... | 83 |
| ICMPP012U6..... | 31 | ICRESAV62V..... | 76 | ICRW33JCxx..... | 83 |
| ICMPP12V5E..... | 31 | ICRESAV82L..... | 76 | ICRW33NCxx..... | 82 |
| ICMPP12V60..... | 31 | ICRESBMP04..... | 76 | ICRW33R6xx..... | 82 |
| ICMPP24CP5..... | 29 | ICRESBMP06..... | 76 | ICRW33R8xx..... | 82 |
| ICMPP24CP6..... | 29 | ICRESCMC06..... | 76 | ICRW33TExx..... | 82 |
| ICMPP024T2..... | 30 | ICRESDC9PD..... | 75 | ICRW44CMxx..... | 83 |
| ICMPP24T2C..... | 30 | ICRESDC9PK..... | 75 | ICRW44EBxx..... | 83 |
| ICMPP024T4..... | 30 | ICRESDC9PW..... | 75 | ICRW44ECxx..... | 83 |
| ICMPP24T4C..... | 30 | ICRESDC14D..... | 73 | ICRW44FExx..... | 83 |
| ICMPP24TF2..... | 30 | ICRESDC14K..... | 73 | ICRW44JCxx..... | 83 |
| ICMPP24TF4..... | 30 | ICRESDC14W..... | 73 | ICRW44NCxx..... | 82 |
| ICMPP024U6..... | 27 | ICRESDC21K..... | 73 | ICRW44R6xx..... | 82 |
| ICMPP48C51..... | 29 | ICRESDC28K..... | 73 | ICRW44R8xx..... | 82 |
| ICMPP48C61..... | 29 | ICRESDCAC3..... | 76 | ICRW44TExx..... | 82 |
| ICMPP48CP5..... | 29 | ICRESDCBUM..... | 76 | ICRWL226xx..... | 84 |
| ICMPP48CP6..... | 29 | ICRESIPA1C..... | 76 | ICRWR11Sxx..... | 82 |
| ICMPP048T2..... | 30 | ICRESIPA2C..... | 76 | ICRWR12Sxx..... | 82 |
| ICMPP48T2C..... | 30 | ICRESIPA3C..... | 76 | ICRWR13Sxx..... | 82 |
| ICMPP048T4..... | 30 | ICRESIPA3D..... | 76 | ICRWR118xx..... | 82 |
| ICMPP48TF2..... | 30 | ICRESIPB1C..... | 76 | ICRWR128xx..... | 82 |
| ICMPP48TF4..... | 30 | ICRESIPB2C..... | 76 | ICRWR138xx..... | 82 |
| ICMPP048U6..... | 27 | ICRESIPB3C..... | 76 | ICRWS226WH..... | 84 |
| ICMPP125EV..... | 31 | ICRESIPB3D..... | 76 |                 |    |
| ICMPP0245E..... | 27 | ICRESDR9PH..... | 76 |                 |    |
| ICMPP245EV..... | 27 | ICRESDR14H..... | 76 |                 |    |
| ICMPP246AS..... | 29 | ICRESDR21H..... | 76 |                 |    |
| ICMPP246AU..... | 29 | ICRESDR28H..... | 76 |                 |    |
| ICMPP0246B..... | 27 | ICRESVPA1C..... | 76 |                 |    |
| ICMPP0485E..... | 27 | ICRESVPA2C..... | 76 |                 |    |
| ICMPP485EV..... | 27 | ICRESVPA3C..... | 76 |                 |    |
| ICMPP0486B..... | 27 | ICRESVPA3D..... | 76 |                 |    |
| ICMPP1260V..... | 31 | ICRESVPB1C..... | 76 |                 |    |
| ICMPP02460..... | 27 | ICRESVPB2C..... | 76 |                 |    |
| ICMPP2460V..... | 27 | ICRESVPB3C..... | 76 |                 |    |
| ICMPP04860..... | 27 | ICRW11CExx..... | 83 |                 |    |
| ICMPP4860V..... | 27 | ICRW11EBxx..... | 83 |                 |    |
| ICMPPICSxx..... | 31 | ICRW11ECxx..... | 83 |                 |    |
| ICMPPMB506..... | 24 | ICRW11EOxx..... | 83 |                 |    |



# Success Stories



Elite Installers™ have won projects for:


- School districts
- University campuses
- Apartment complexes
- Medical hospitals
- Five-star hotels and resorts
- Government buildings
- Commercial buildings
- Retail stores
- Community centers
- Financial institutions
- And more!

Visit [icc.com/success](http://icc.com/success) to learn more.

# Commercial Residential



# Copper Fiber

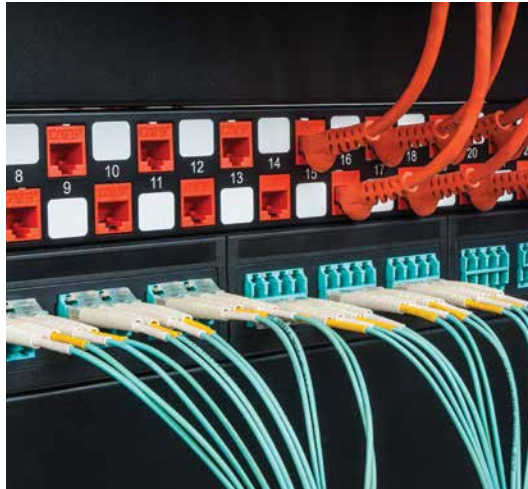

# Structured Cabling Solutions



📍 2100 E Valencia Dr, Ste D Fullerton, CA 92831

🌐 [icc.com](http://icc.com)

☎ (888) ASK.4ICC (275.4422)

The information in this document is deemed to be reliable and accurate, but is subject to change without notice. ICC is not responsible for misprints, obsolete information, or errors.

MMILIT0448-18