

DECORATIVE LIGHTING

JUNE SUPPLEMENT



KICHLER.

WELCOME

Have you ever looked at a living space and thought, "It just needs something?" Lighting from Kichler is that essential ingredient that can transform a room, ensuring the success of your decorating or remodeling project.

Step inside our offering, and you'll see opportunities for true personal expression. You'll discover bold chandeliers, stylish pendants and unique wall sconces that are sleek and attention-getting ... smart collections designed around the trends ... and finishes that are fun and fresh. Then, turn on a Kichler light, and watch everything in your room come together. See your living space more clearly ... make the sofa look a little cozier ... bring warmth to the nighttime hours. Can a light fixture do all that? When it's by Kichler, it's designed to deliver a stunning quality of light that makes your space more beautiful – and more livable.

Your home. Thousands of different Kichler ways to bring it to light.





TABLE OF CONTENTS

- s810 Collections
- s844 Pendants
- s849 Wall Sconces
- s852 Bath & Vanity
- s864 Outdoor
- s876 ENERGY STAR Rated, High-Use LED
- s880 Legend
- s882 Index

Connect With Us



Like us on Facebook: facebook.com/Kichler.Lighting
Follow us on twitter: twitter.com/kichlerlight
Watch us on YouTube: youtube.com/KichlerLighting
Join us on Houzz: houzz.com/pro/kichlerlighting/kichler
Find us on Pinterest: pinterest.com/kichlerstyle

Palisades Pendants 49806 OZNW, 49808 OZNW and 49809 OZNW
South Hope™ LED Lantern 49473 RZLED | Page s869

TABLE OF CONTENTS

LIGHTING COLLECTIONS

Aberdeen	s816
Amira™ LED	s854
Ashton LED	s875
Braelyn™	s822, s850
Branches.....	s812
Cambria LED	s856
Flush Mount LED	s877
Horizon LED Downlights.....	s878
Indeco™ LED	s851, s858
Kayde™	s820, s850
LED Downlights	s879
Lyndon™ LED.....	s867
Northland™	s873
Pendants.....	s844
Piper	s832, s851
Riviera	s846
South Hope™ LED	s869
Suri	s870
Tallie™	s839, s851, s862
Titus.....	s828, s850
Wall Sconces	s849

INDOOR LIGHTING VISUAL INDEX



Aberdeen
s816



Amira™ LED
s854



Braelyn™
s822, s850



Branches
s812



Cambria LED
s856



Flush Mount LED
s877



INDOOR LIGHTING VISUAL INDEX



Horizon LED Downlights
s878



Indeco™ LED
s851, s858



Kayde™
s820, s850



LED Downlights
s879



Pendants
s844



Piper
s832, s851



Riviera
s846



Tallie™
s839, s851, s862



Titus
s828, s850



Wall Sconces
s849

OUTDOOR LIGHTING VISUAL INDEX



Aston LED
s875



Northland™
s873



Suri
s870



Lyndon™ LED
s867




South Hope™ LED
s869

COLLECTIONS

INSPIRED & ENTICING

With a Kichler Collection, you get so much more than just the centerpiece to a space — you get the entire room. Each style family includes that all-important focal piece as well as everything else you need to light adjoining spaces: sconces, pendants, ceiling fixtures and more. You can layer light with coordinated style while outfitting a room, open floor plan — or your entire home — with one look. Pick one family, and you're assured a beautiful look.

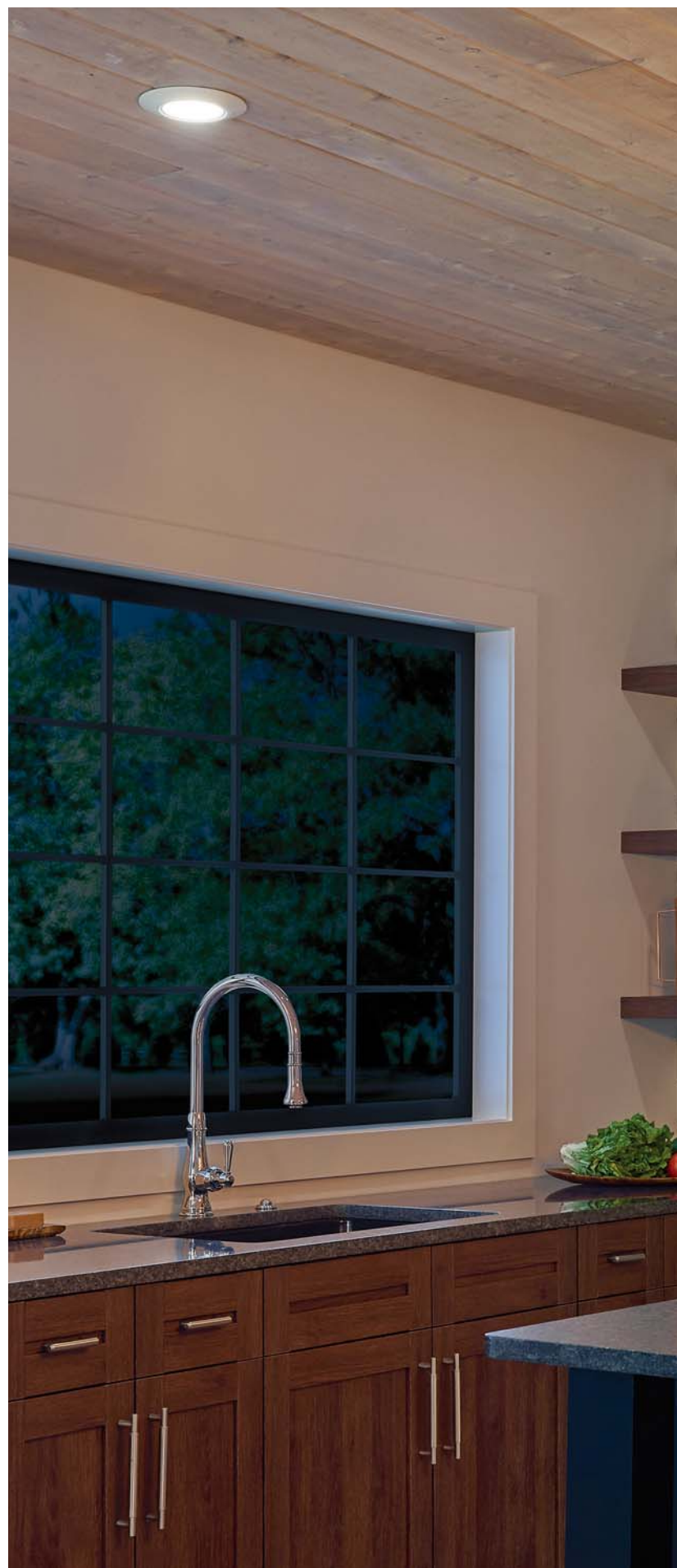



Braelyn™ Linear Chandelier 43457 CLP | Page s824, Horizon LED Downlights 43855 WHLED30T | Page s878



Branches

Inspired by the asymmetric patterns found in nature, Branches is anything but simple. The soft contemporary shapes and mixed metal finishes give each piece a metropolitan flair that works above kitchen islands, dining tables — even as a focal point in a foyer.



BRANCHES

BLACK FINISH WITH
ANTIQUE PEWTER ACCENTS




A | 43795 BK
Linear Chandelier
NOT TO SCALE



BRANCHES

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/STEM	NOTES
A	43795	BK	(7) 60W (M)	25.25W x 19.75H x 49.25L	23.65	96	36	Additional chain 2996 BK. Additional stem 4935 BK. Sloped ceiling kit included.
B	43793	BK	(3) 60W (M)	22.25W x 8H	41.90	78	36	Additional chain 2996 BK. Additional stem 2999 BK. Sloped ceiling kit included.
C	43794	BK	(4) 60W (M)	2.5W x 19.5H x 33.5L	45.56	110	36	Additional chain 2996 BK. Additional stem 2999 BK. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

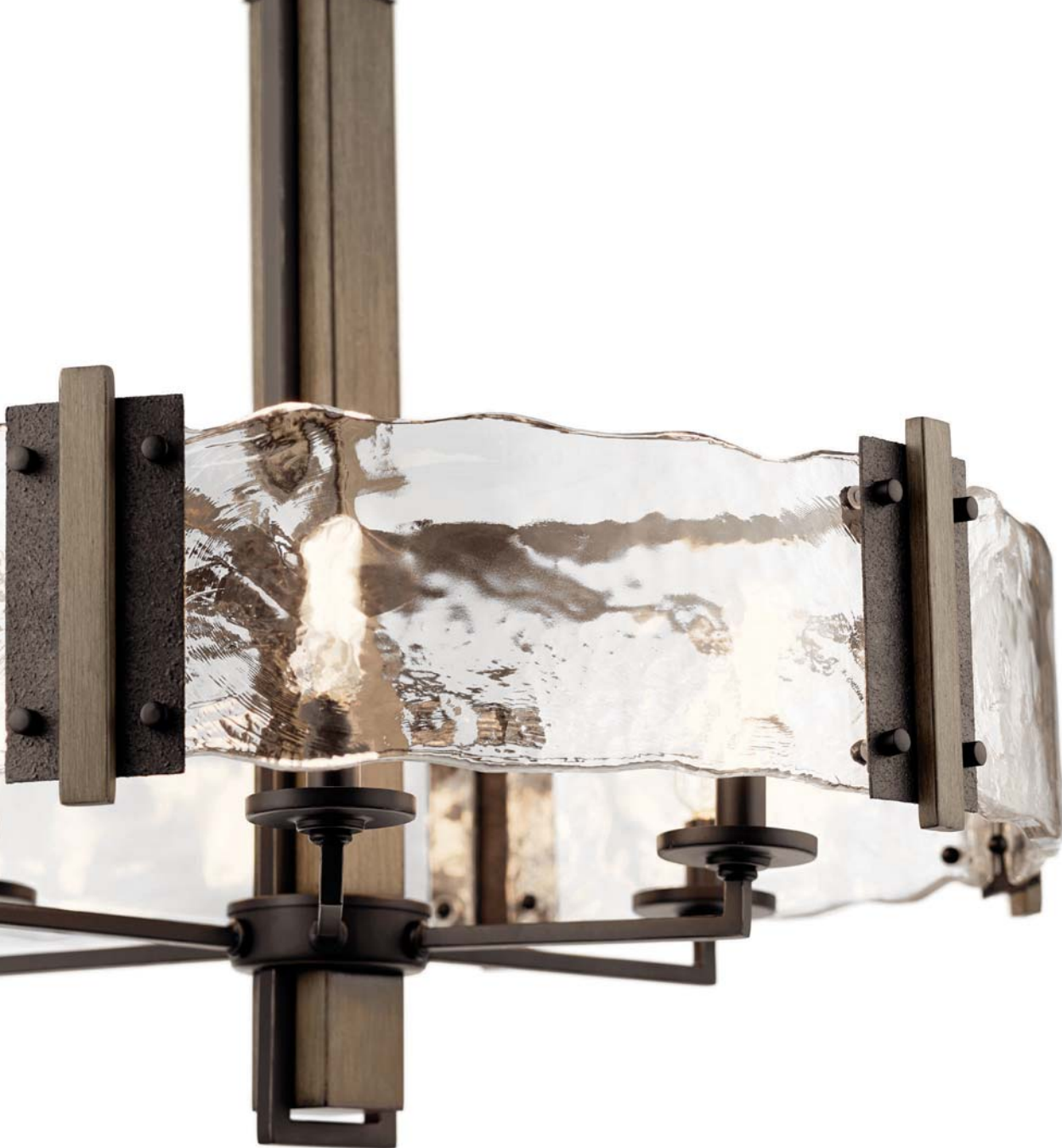

Aberdeen

Metal finishes combine with free-flowing glass to give Aberdeen an artisan feel. Layers of rich metal form the foundation. Thick, Piastra glass surrounds the light, creating the impression of water ripples in nature. The effect is one that's stunning when the fixture is on or off.



ABERDEEN

OLD BRONZE® FINISH AND DISTRESSED
ANTIQUE GRAY FINISH WITH RUST ACCENTS
AND PIASTRA GLASS



A | 43896 OZ
Linear Chandelier
NOT TO SCALE



B | 43895 OZ
Chandelier



C | 43898 OZ
Mini Pendant

ABERDEEN

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRLL. H	EXTRA WIRE	CHAIN/STEM	NOTES
A	43896	OZ	(3) 100W (M)	7.75W x 9.75H x 42.5L	48	98	36	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.
B	43895	OZ	(6) 60W (C)	28W x 26H	100	55	72	Additional chain 4901 OZ.
C	43898	OZ	(1) 100W (M)	7.25W x 17.25H	55	69	36	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

KAYDE™

CLASSIC PEWTER FINISH
WITH CLEAR SEEDED GLASS



B | 42126 CLP
Wall Sconce
LE



A | 42125 CLP
Mini Pendant
LE



C | 42124 CLP
Linear Chandelier
LE

KAYDE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRLL. H	L	EXTRA WIRE	CHAIN/ STEM	EXT.	HCWO	NOTES
A	42125	CLP	(1) 100W (M)	4.5W x 9.75H	48	---	67	36	---	---	Add. chain 2996 CLP. Add. stem 2999 CLP. Sloped ceiling kit included.
B	42126	CLP	(1) 100W (M)	4.75W x 12.5H	---	---	---	---	5.75	8	D
C	42124	CLP	(5) 100W (M)	4.25W x 15H x 40L	53	40	98	36	---	---	Add. chain 2996 CLP. Add. stem 2999 CLP. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

KAYDE™

OLDE BRONZE® FINISH
WITH CLEAR SEEDED GLASS



A | 42125 OZ
Mini Pendant



B | 42126 OZ
Wall Sconce



C | 42124 OZ
Linear Chandelier

Vintage
Filament Bulb



Sold Separately
4071 CLR

KAYDE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	L	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	42125	OZ	(1) 100W (M)	4.5W x 9.75H	48	---	67	36	---	---	Add. chain 2996 OZ. Add. stem 2999 OZ. Sloped ceiling kit included.
B	42126	OZ	(1) 100W (M)	4.75W x 12.5H	---	---	---	---	5.75	8	D
C	42124	OZ	(5) 100W (M)	4.25W x 15H x 40L	53	40	98	36	---	---	Add. chain 2996 OZ. Add. stem 2999 OZ. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.



Braelyn™

The vintage industrial design is punctuated with Clear Seeded glass shades, reminiscent of glass jars that were a staple of 19th century American life. The optional vintage filament light bulbs enhance this style, making the fixtures the perfect addition to any space.



BRAELYN™

CLASSIC PEWTER FINISH WITH
CLEAR SEEDED GLASS



B | 43059 CLP
Linear Chandelier
LE



A | 43457 CLP
Linear Chandelier
LE

BRAELYN™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	NOTES
A	43457	CLP	(8) 60W (M)	15W x 11.25H x 42L	50	110	36	Additional chain 2996 CLP. Additional stem 2999 CLP. Sloped ceiling kit included.
B	43059	CLP	(6) 60W (M)	15W x 11.25H x 34L	49	111	36	Additional chain 2996 CLP. Additional stem 2999 CLP. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.



C | 45457 CLP
Wall Sconce
LE



D | 43060 CLP
Mini Pendant
LE



Shown as
Mini Chandelier - 11.25" H.

CONVERTIBLE

Create two distinct lighting
options with one fixture:
Mini Chandelier or Semi Flush.

F | 43057 CLP
LE



Shown as
Semi Flush - 12" H.



E | 43058 CLP
Chandelier
LE

Vintage
Filament Bulb



Sold Separately
4071 CLR

BRAELYN™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
C	45457	CLP	(1) 60W (M)	5W x 9.5H	---	---	---	5.75	6	D
D	43060	CLP	(1) 60W (M)	3.75W x 8.5H	47	68	36	---	---	Additional chain 2996 CLP. Additional stem 2999 CLP. Sloped ceiling kit included.
E	43058	CLP	(5) 60W (M)	25W x 11.25H	50	106	36	---	---	Additional chain 2996 CLP. Additional stem 2999 CLP. Sloped ceiling kit included.
F	43057	CLP	(3) 60W (M)	18W x 11.25H	50	74	36	---	---	Additional chain 2996 CLP. Additional stem 2999 CLP. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

BRAELYN™

OLDE BRONZE® FINISH WITH
CLEAR SEEDED GLASS



B | 43059 OZ
Linear Chandelier



A | 43457 OZ
Linear Chandelier

BRAELYN™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	NOTES
A	43457	OZ	(8) 60W (M)	15W x 11.25H x 42L	50	110	36	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.
B	43059	OZ	(6) 60W (M)	15W x 11.25H x 34L	49	111	36	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.



C | 45457 OZ
Wall Sconce



D | 43060 OZ
Mini Pendant



Shown as
Mini Chandelier - 11.25" H.

CONVERTIBLE

Create two distinct lighting
options with one fixture:
Mini Chandelier or Semi Flush.

F | 43057 OZ



Shown as
Semi Flush - 12" H.



E | 43058 OZ
Chandelier

Matching
Bath



45459 OZ

Vintage
Filament Bulb



Sold Separately
4071 CLR

BRAELYN™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	EXT.	HCWO	NOTES
C	45457	OZ	(1) 60W (M)	5W x 9.5H	---	---	---	5.75	6	D
D	43060	OZ	(1) 60W (M)	3.75W x 8.5H	47	68	36	---	---	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.
E	43058	OZ	(5) 60W (M)	25W x 11.25H	50	106	36	---	---	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.
F	43057	OZ	(3) 60W (M)	18W x 11.25H	50	74	36	---	---	Additional chain 2996 OZ. Additional stem 2999 OZ. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.



Titus

Black mesh ironwork with a Polished Nickel finish lends an industrial touch to the modern, sleek Titus collection.



TITUS

POLISHED NICKEL FINISH WITH
BLACK MESH OUTER SHADE



A | 43712 PN
Oval Chandelier / Pendant
NOT TO SCALE

B | 43722 PN
Mini Pendant
LE



C | 43715 PN
Pendant



Shown as Pendant - 9.75" H.

CONVERTIBLE

Create two distinct lighting options with one fixture:
Pendant or Semi Flush.

E | 43713 PN



Black Mesh
Shade

D | 43716 PN
Wall Sconce



Shown as Semi Flush - 10.5" H.

TITUS

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL H	L	STEM TILT	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	43712	PN	(8) 60W (C) B Type / G Type / 40W T Type	17W x 9.75H	48	37.25	90°	110	36	---	---	Additional stem 4935 CLP.
B	43722	PN	(1) 100W (M) A19	6.5W x 9H	48	---	90°	69	36	---	---	Additional stem 2999 PN.
C	43715	PN	(8) 60W (C) B Type / G Type / 40W T Type	25W x 9.75H	48	---	90°	73	36	---	---	Additional stem 2999 PN.
D	43716	PN	(1) 60W (C) B Type / G Type / 40W T Type	6W x 12H	---	---	---	---	---	4	6	D
E	43713	PN	(4) 60W (C) B Type / G Type / 40W T Type	14.25W x 9.75H	48	---	90°	73	36	---	---	Additional stem 2999 PN.

Measurements shown in inches. U.S. & Canada Patent Pending.



Piper

The Piper collection mixes modern with grace with its delicate glass bead accents. Making this a focal point in any room is the linear detail in the clear glass and metal rods finished in Espresso or Polished Chrome.



PIPER

POLISHED CHROME FINISH WITH ALTERNATING
CLEAR GLASS & POLISHED CHROME METAL
RODS, ACCENTED WITH CLEAR GLASS SPHERES



A | 43723 CH
Chandelier / Pendant
LE



B | 43758 CH
Grand Chandelier
LE



C | 43724 CH
Foyer Chandelier
LE



D | 43725 CH
Oval Chandelier / Pendant
LE



E | 43726 CH
Semi Flush
LE



F | 43727 CH
Wall Sconce
LE

PIPER

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRLL. H	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	43723	CH	(6) 60W (C)	24W x 31.25H	106	45	72	---	---	Additional chain 4901 CH.
B	43758	CH	(18) 60W (C)	22W x 69.75H	144	22	72	---	---	Additional chain 4909 CH.
C	43724	CH	(6) 60W (C)	16W x 33.25H	108	15	72	---	---	Additional chain 4901 CH.
D	43725	CH	(6) 60W (C)	13.5W x 12.25H x 36L	51	100	36	---	---	
E	43726	CH	(3) 60W (C)	15W x 14.75H	---	---	---	---	---	
F	43727	CH	(2) 60W (C)	8W x 12.25H	---	---	---	4	4.75	

Measurements shown in inches. U.S. & Canada Patent Pending.

PIPER

ESPRESSO FINISH WITH ALTERNATING CLEAR
GLASS & ESPRESSO METAL RODS, ACCENTED
WITH CLEAR GLASS SPHERES



A | 43723 ESP
Chandelier / Pendant



B | 43758 ESP
Grand Chandelier



C | 43724 ESP
Foyer Chandelier



D | 43725 ESP
Oval Chandelier / Pendant



E | 43726 ESP
Semi Flush



F | 43727 ESP
Wall Sconce

PIPER

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	43723	ESP	(6) 60W (C)	24W x 31.25H	106	45	72	---	---	Additional chain 4901 ESP.
B	43758	ESP	(18) 60W (C)	22W x 69.75H	144	22	72	---	---	Additional chain 4909 ESP.
C	43724	ESP	(6) 60W (C)	16W x 33.25H	108	15	72	---	---	Additional chain 4901 ESP.
D	43725	ESP	(6) 60W (C)	13.5W x 12.25H x 36L	51	100	36	---	---	
E	43726	ESP	(3) 60W (C)	15W x 14.75H	---	---	---	---	---	
F	43727	ESP	(2) 60W (C)	8W x 12.25H	---	---	---	4	4.75	

Measurements shown in inches. U.S. & Canada Patent Pending.



Tallie™ Chandelier 43149 AP | Page s839, Horizon LED Downlights 43855 WHLED30T | Page s882

TALLIE™

ANTIQUE PEWTER FINISH WITH
SATIN-ETCHED WHITE GLASS INNER
DIFFUSERS WITH WHITE TRANSLUCENT
ORGANZA OUTER SHADES



A | 43149 AP
Chandelier



B | 43150 AP
Chandelier

TALLIE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	NOTES
A	43149	AP	(5) 60W (C)	24W x 20.5H	95	36	72	Additional chain 2996 AP. G Type bulb recommended.
B	43150	AP	(9) 60W (C)	32W x 28.5H	103	36	72	Additional chain 2996 AP. G Type bulb recommended.

Measurements shown in inches. U.S. & Canada Patent Pending.

TALLIE™

ANTIQUE PEWTER FINISH WITH
SATIN-ETCHED WHITE GLASS INNER
DIFFUSERS WITH WHITE TRANSLUCENT
ORGANZA OUTER SHADES



A | 43151 AP
Chandelier
NOT TO SCALE

Matching
Bath



45451 AP



B | 43152 AP
Mini Pendant



C | 43153 AP
Pendant



D | 43139 AP
Foyer Pendant



E | 45449 AP
Wall Sconce



F | 43194 AP
Semi Flush



G | 43154 AP
Semi Flush

TALLIE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	STEM TILT	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	43151	AP	(12) 60W (C)	42W x 34.5H	109	---	36	72	---	---	Additional chain 2996 AP. G Type bulb recommended.
B	43152	AP	(1) 50W (G9)	6W x 6.25H	44	90°	68	36	---	---	Additional stem 2999 AP. Halogen bulb Included
C	43153	AP	(3) 100W (M)	18W x 21.75H	96	---	23	72	---	---	Additional chain 2996 AP.
D	43139	AP	(3) 60W (C)	20W x 31H	105	---	23	72	---	---	Additional chain 2996 AP. G Type bulb recommended.
E	45449	AP	(1) 60W (C)	5W x 7.5H	---	---	---	---	6.5	3.75	Ⓟ G Type bulb recommended.
F	43194	AP	(3) 100W (M)	18W x 11.75H	---	---	---	---	---	---	
G	43154	AP	(2) 100W (M)	13.5W x 11.5H	---	---	---	---	---	---	

Measurements shown in inches. U.S. & Canada Patent Pending.

TALLIE™

MISSION BRONZE™ FINISH WITH
SATIN-ETCHED WHITE GLASS INNER
DIFFUSERS WITH LIGHT UMBER
TRANSLUCENT ORGANZA OUTER SHADES



A | 43151 MIZ
Chandelier



B | 43149 MIZ
Chandelier



C | 43150 MIZ
Chandelier

Matching
Bath



45451 MIZ



D | 43152 MIZ
Mini Pendant



E | 43153 MIZ
Pendant



F | 43139 MIZ
Foyer Pendant



G | 45449 MIZ
Wall Sconce



H | 43194 MIZ
Semi Flush



J | 43154 MIZ
Semi Flush

TALLIE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	STEM TILT	EXTRA WIRE	CHAIN/STEM	EXT.	HCWO	NOTES
A	43151	MIZ	(12) 60W (C)	42W x 34.5H	109	---	36	72	---	---	Additional chain 2996 MIZ. G Type bulb recommended.
B	43149	MIZ	(5) 60W (C)	24W x 20.5H	95	---	36	72	---	---	Additional chain 2996 MIZ. G Type bulb recommended.
C	43150	MIZ	(9) 60W (C)	32W x 28.5H	103	---	36	72	---	---	Additional chain 2996 MIZ. G Type bulb recommended.
D	43152	MIZ	(1) 50W (G9)	6W x 6.25H	44	90°	68	36	---	---	Additional stem 2999 MIZ. Halogen bulb Included.
E	43153	MIZ	(3) 100W (M)	18W x 21.75H	96	---	23	72	---	---	Additional chain 2996 MIZ.
F	43139	MIZ	(3) 60W (C)	20W x 31H	105	---	23	72	---	---	Additional chain 2996 MIZ. G Type bulb recommended.
G	45449	MIZ	(1) 60W (C)	5W x 7.5H	---	---	---	---	6.5	3.75	Ⓟ G Type bulb recommended.
H	43194	MIZ	(3) 100W (M)	18W x 11.75H	---	---	---	---	---	---	
J	43154	MIZ	(2) 100W (M)	13.5W x 11.5H	---	---	---	---	---	---	

Measurements shown in inches. U.S. & Canada Patent Pending.

PENDANTS

BIG & BOLD

When it comes to pendants, let your imagination – and your creativity – guide you. Today's most popular pendants “think big” – with oversized styles and a mixture of textures and finishes that work in a variety of spaces. Place one alone above a seating area, nightstand or reading nook. Bring extra task lighting to a master bath or home office. Cluster several above kitchen workspaces. These great, anything-goes lights are designed for versatility and ingenuity.





Riviera Pendants 43954 NI and 43955 NI | Page s847

RIVIERA

OLDE BRONZE® FINISH
WITH CLEAR RIBBED GLASS



A | 43953 OZ
Pendant
LE



B | 43954 OZ
Pendant
LE



C | 43955 OZ
Pendant
LE

Vintage
Filament Bulb



Sold Separately
4071 CLR

RIVIERA

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRLL. H	EXTRA WIRE	CHAIN/ STEM	NOTES
A	43953	OZ	(1) 100W (M)	9W x 16H	46	62	36	Add. chain 2996 OZ. Add. stem 2999 OZ. Sloped ceiling kit incl.
B	43954	OZ	(1) 100W (M)	7.75W x 13.75H	52	66	36	Add. chain 2996 OZ. Add. stem 2999 OZ. Sloped ceiling kit incl.
C	43955	OZ	(1) 100W (M)	11.5W x 13H	51	66	36	Add. chain 2996 OZ. Add. stem 2999 OZ. Sloped ceiling kit incl.

Measurements shown in inches. U.S. & Canada Patent Pending.

RIVIERA

BRUSHED NICKEL FINISH
WITH CLEAR RIBBED GLASS



A | 43953 NI
Pendant



B | 43954 NI
Pendant



C | 43955 NI
Pendant

Vintage
Filament Bulb



Sold Separately
4071 CLR

RIVIERA

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	NOTES
A	43953	NI	(1) 100W (M)	9W x 16H	46	62	36	Add. chain 2996 NI. Add. stem 2999 NI. Sloped ceiling kit incl.
B	43954	NI	(1) 100W (M)	7.75W x 13.75H	52	66	36	Add. chain 2996 NI. Add. stem 2999 NI. Sloped ceiling kit incl.
C	43955	NI	(1) 100W (M)	11.5W x 13H	51	66	36	Add. chain 2996 NI. Add. stem 2999 NI. Sloped ceiling kit incl.

Measurements shown in inches. U.S. & Canada Patent Pending.



Chalkboard Sconce 44015 WZC | Page s849

WALL SCONCES

WEATHERED ZINC FINISH AND
DISTRESSED ANTIQUE GRAY FINISH



A | 44015 WZC
Chalkboard Sconce

CHALKBOARD SCONCE

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	EXT.	HCWO	NOTES
A	44015	WZC	(1) 40W (M)	12.5W x 24H	9	14.5	Includes on/off switch and capability to hard wire or plug into wall outlet.

Measurements shown in inches. U.S. & Canada Patent Pending.

WALL SCONCES

ASSORTED FINISHES & GLASS



A | 45457 CLP
Braelyn™



B | 42126 CLP
Kayde™



C | 43716 PN
Titus



A | 45457 OZ
Braelyn™



B | 42126 OZ
Kayde™



D | 6520 OZ
Swiss Passport

WALL SCONCES

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	EXT.	HCWO	NOTES
A	45457	CLP, OZ	(1) 60W (M)	5W x 9.5H	5.75	6	D
B	42126	CLP	(1) 100W (M)	4.75W X 12.5H	5.75	8	D
C	43716	PN	(1) 60W (C) B Type / G Type / 40W T Type	6W x 12H	4	6	D
D	6520	OZ	(1) 75W (M)	6W X 8H	4	4	

Measurements shown in inches. U.S. & Canada Patent Pending.



A | **45686 NBRLED**
Indeco™ LED
ADA Compliant



B | **45449 AP**
Tallie™



C | **43727 CH**
Piper



A | **45686 PNLED**
Indeco™ LED
ADA Compliant



B | **45449 MIZ**
Tallie™



C | **43727 ESP**
Piper

WALL SCONCES

	ITEM #	FINISH	LIGHT SOURCE	LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45686	NBRLED, PNLED	(1) 16W 	3000K, 90 CRI, 1915 Lumens, 61 LPW	5W x 14.5H	3.75	12	 May be installed with the glass up or down. Dimmable.
B	45449	AP, MIZ	(1) 60W (C)	---	5W x 7.5H	6.5	3.75	 G Type bulb recommended.
C	43727	CH, ESP	(2) 60W (C)	---	8W x 12.25H	4	4.75	

Measurements shown in inches. U.S. & Canada Patent Pending.


BATH & VANITY

PERSONAL & WELCOMING

No room is more personal than the bath. From urban styles to traditional looks, our Bath & Vanity Collection has a lighting family ready to complement any style and enhance any task. Our latest styles incorporate highly energy-efficient LED into slim and streamlined shapes — delivering an ample amount of light for putting on makeup to brushing your teeth to relaxing in the tub.





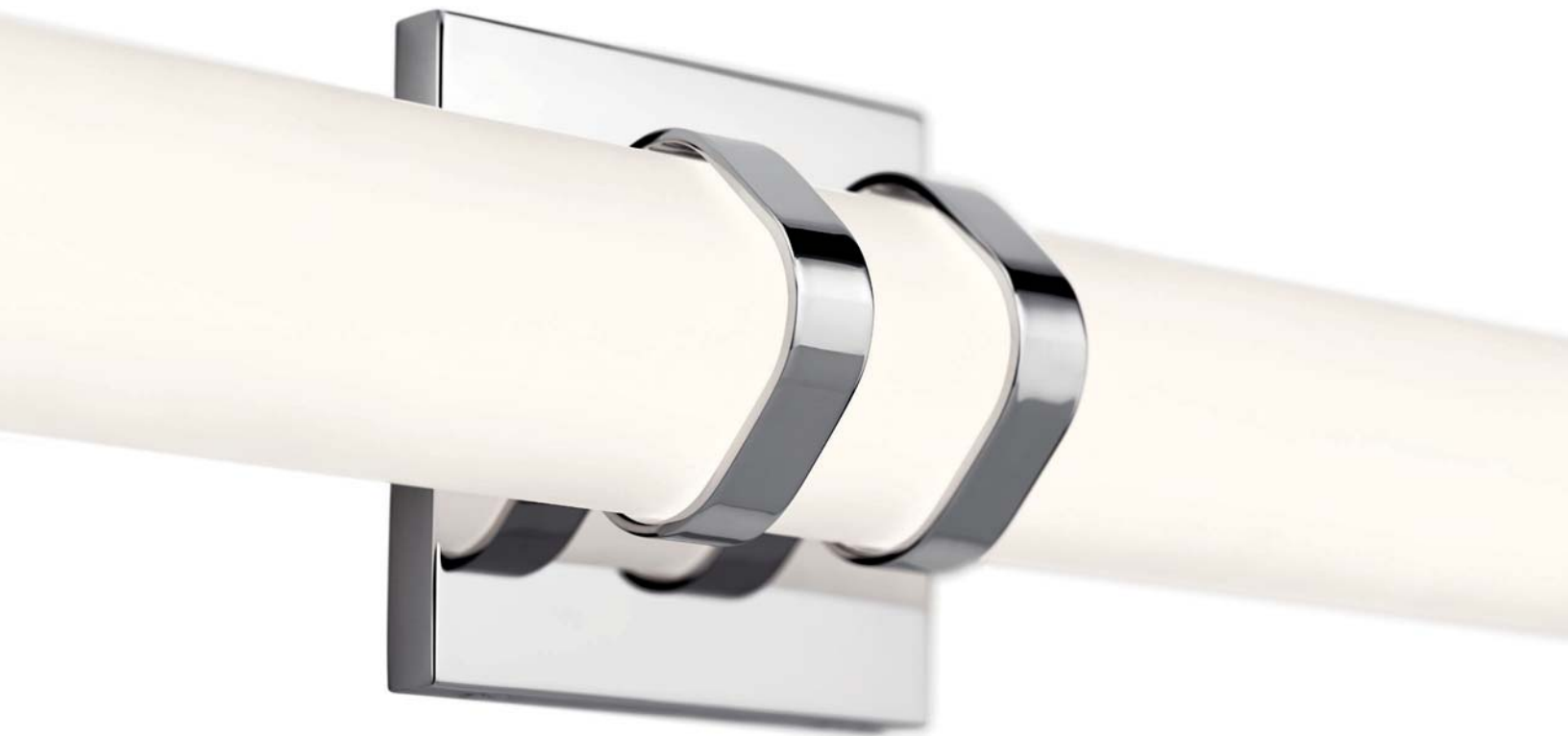

Amira™ LED

Slim from any angle: Amira's™ design makes a contemporary statement without overtaking a space. The Satin-Etched White glass features an offset square shape, combining gentle curves with modern geometric form.

AMIRA™ LED

POLISHED CHROME FINISH
WITH SATIN-ETCHED WHITE GLASS

A | **45683 CHLED**
Multi-Positional
ADA Compliant



B | **45682 CHLED**
Multi-Positional
ADA Compliant



A | **45683 CHLED**
Multi-Positional
ADA Compliant



B | **45682 CHLED**
Multi-Positional
ADA Compliant



AMIRA™ LED

	ITEM #	FINISH	LIGHT SOURCE	* LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45683	CHLED	(4) 46W 	3000K, 90 CRI, 2470 Lumens, 53 LPW	36.5W x 5H	3.25	2.5	  May be installed vertically or horizontally. Dimmable.
B	45682	CHLED	(2) 31W 	3000K, 90 CRI, 1650 Lumens, 53 LPW	24.75W x 5H	3.25	2.5	  May be installed vertically or horizontally. Dimmable.

*Delivered Lumens shown

Measurements shown in inches. U.S. & Canada Patent Pending.

CAMBRIA LED

BRUSHED NICKEL FINISH
WITH SATIN-ETCHED WHITE GLASS

A | **45679 NILED**
Multi-Positional
ADA Compliant



B | **45680 NILED**
Multi-Positional
ADA Compliant



A | **45679 NILED**
Multi-Positional
ADA Compliant



B | **45680 NILED**
Multi-Positional
ADA Compliant



CAMBRIA LED

	ITEM #	FINISH	LIGHT SOURCE	* LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45679	NILED	(2) 31W 	3000K, 90 CRI, 1650 Lumens, 53 LPW	26.5W x 5H	3.5	2.5	  May be installed vertically or horizontally. Dimmable.
B	45680	NILED	(4) 46W 	3000K, 90 CRI, 2470 Lumens, 53 LPW	38.5W x 5H	3.5	2.5	  May be installed vertically or horizontally. Dimmable.

Measurements shown in inches. U.S. & Canada Patent Pending.

*Delivered Lumens shown

CAMBRIA LED

POLISHED CHROME FINISH
WITH SATIN-ETCHED WHITE GLASS

A | **45680 CHLED**
Multi-Positional
ADA Compliant



B | **45679 CHLED**
Multi-Positional
ADA Compliant



A | **45680 CHLED**
Multi-Positional
ADA Compliant



B | **45679 CHLED**
Multi-Positional
ADA Compliant




CAMBRIA LED

	ITEM #	FINISH	LIGHT SOURCE	* LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45680	CHLED	(4) 46W 	3000K, 90 CRI, 2470 Lumens, 53 LPW	38.5W x 5H	3.5	2.5	 May be installed vertically or horizontally. Dimmable.
B	45679	CHLED	(2) 31W 	3000K, 90 CRI, 1650 Lumens, 53 LPW	26.5W x 5H	3.5	2.5	 May be installed vertically or horizontally. Dimmable.

*Delivered Lumens shown

Measurements shown in inches. U.S. & Canada Patent Pending.

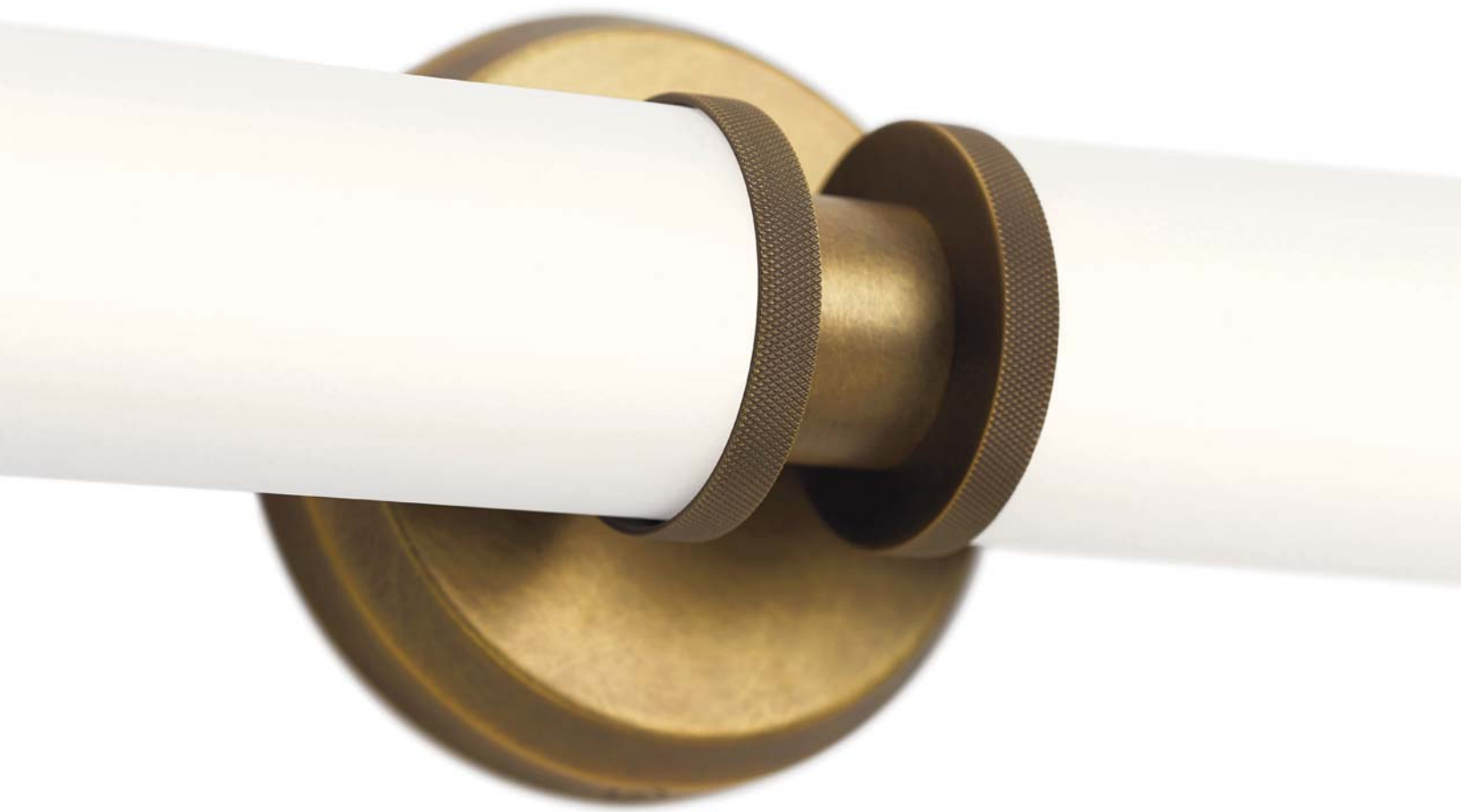

Indeco™ LED

Inspired by the diamond knurl pattern that's common in hardware, Indeco™ combines classic lines with mechanical touches. The energy efficient integrated LED projects a soft, white light that keeps colors in their natural state.



INDECO™ LED


POLISHED NICKEL FINISH
WITH SATIN-ETCHED WHITE GLASS



A | **45686 PNLED**
Wall Sconce
ADA Compliant



B | **45685 PNLED**
Multi-Positional
ADA Compliant

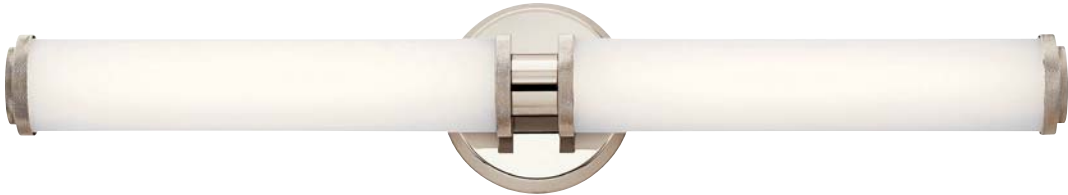

B | **45685 PNLED**
Multi-Positional
ADA Compliant

INDECO™ LED

	ITEM #	FINISH	LIGHT SOURCE	* LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45686	PNLED	(1) 16W 	3000K, 90 CRI, 1090 Lumens, 68 LPW	5W x 14.5H	3.75	12	 May be installed with the glass up or down. Dimmable.
B	45685	PNLED	(2) 31W 	3000K, 90 CRI, 1915 Lumens, 61 LPW	27W x 5H	3.75	2.5	 May be installed vertically or horizontally. Dimmable.

Measurements shown in inches. U.S. & Canada Patent Pending.

*Delivered Lumens shown

INDECO™ LED

NATURAL BRASS FINISH
WITH SATIN-ETCHED WHITE GLASS

A | **45685 NBRLED**
Multi-Positional
ADA Compliant



B | **45686 NBRLED**
Wall Sconce
ADA Compliant

A | **45685 NBRLED**
Multi-Positional
ADA Compliant



INDECO™ LED

	ITEM #	FINISH	LIGHT SOURCE	* LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	45685	NBRLED	(2) 31W 	3000K, 90 CRI, 1915 Lumens, 68 LPW	27W x 5H	3.75	2.5	 May be installed vertically or horizontally. Dimmable.
B	45686	NBRLED	(1) 16W 	3000K, 90 CRI, 1090 Lumens, 61 LPW	5W x 14.5H	3.75	12	 May be installed with the glass up or down. Dimmable.

*Delivered Lumens shown

Measurements shown in inches. U.S. & Canada Patent Pending.

TALLIE™

ANTIQUE PEWTER FINISH WITH SATIN-ETCHED
WHITE GLASS INNER DIFFUSERS WITH WHITE
TRANSLUCENT ORGANZA OUTER SHADES



A | 45449 AP
Wall Sconce
NOT TO SCALE



B | 45450 AP



C | 45451 AP



D | 45452 AP

Matching
Collection



43149 AP

TALLIE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	EXT.	HCWO	NOTES
A	45449	AP	(1) 60W (C)	5W x 7.5H	6.5	3.75	Ⓛ G Type bulb recommended.
B	45450	AP	(2) 60W (C)	12.5W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.
C	45451	AP	(3) 60W (C)	20.5W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.
D	45452	AP	(4) 60W (C)	28.25W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.

Measurements shown in inches. U.S. & Canada Patent Pending.

TALLIE™

MISSION BRONZE™ FINISH WITH SATIN-ETCHED
WHITE GLASS INNER DIFFUSERS WITH BROWN-
TRIMMED WHITE ORGANZA OUTER SHADES



B | 45450 MIZ



C | 45451 MIZ



A | 45449 MIZ
Wall Sconce
NOT TO SCALE



D | 45452 MIZ

TALLIE™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	EXT.	HCWO	NOTES
A	45449	MIZ	(1) 60W (C)	5W x 7.5H	6.5	3.75	Ⓛ G Type bulb recommended.
B	45450	MIZ	(2) 60W (C)	12.5W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.
C	45451	MIZ	(3) 60W (C)	20.5W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.
D	45452	MIZ	(4) 60W (C)	28.25W x 7.5H	6.75	3.75	Ⓛ G Type bulb recommended.

Measurements shown in inches. U.S. & Canada Patent Pending.

OUTDOOR

STYLE & SAFETY

When it comes to the beauty of your home's exterior, there's a lot to consider. Curb appeal. Architectural interest. And let's not forget "location, location, location." With Kichler outdoor collections, there are so many opportunities to add light and style to a variety of locations with coordinated ease: entryways, driveways, pathways, decks, dining areas and more. Outdoor-rated chandeliers add drama, while on-trend black finishes hold up to the elements. With more light comes more reasons to head outside – extending the function of your outdoor spaces well after dark.





Lyndon™ Portable LED Lantern 49500 BKTLED | Page s867



Lydon™ LED Indoor/Outdoor Lantern 49500 BKTLED | Page s867

LYNDON™ LED

LED PORTABLE LANTERN
WITH BLUETOOTH® SPEAKER
TEXTURED BLACK FINISH WITH
ETCHED SEEDED GLASS



A | 49500 BKTLED
Indoor/Outdoor Lantern
LE



Full function indicator buttons
for audio and light dimming.



Integrated Speaker

LYNDON™ LED

ITEM #	FINISH	LIGHT SOURCE	LED OUTPUT	DIMENSIONS	NOTES
A 49500	BKTLED	7W	3000K, 80 CRI, 250 Lumens	8W X 19H X 8L	Dimmable. Rechargeable with power adapter.

Visit kichler.com for more information.

Measurements shown in inches. U.S. & Canada Patent Pending.



South Hope™ Indoor/Outdoor Lantern 49473 RZLED | Page s869

SOUTH HOPE™ LED

LED PORTABLE LANTERN
WITH BLUETOOTH® SPEAKER
RUBBED BRONZE FINISH WITH
SATIN-ETCHED CASED OPAL GLASS



A | 49473 RZLED
Indoor/Outdoor Lantern
LE



Full function indicator buttons
for audio and light dimming.



Integrated Speaker

SOUTH HOPE™ LED

	ITEM #	FINISH	LIGHT SOURCE	LED OUTPUT	DIMENSIONS	NOTES
A	49473	RZLED	7W	3000K, 80 CRI, 250 Lumens	6W X 19H X 6L	Dimmable. Rechargeable with power adapter.

Visit kichler.com for more information.

Measurements shown in inches. U.S. & Canada Patent Pending.

SURI

TEXTURED BLACK FINISH WITH
CLEAR SEEDED GLASS



A | 49857 BKT
Outdoor Wall



B | 49858 BKT
Outdoor Wall



C | 49859 BKT
Outdoor Wall

Climates™



Resistant against rust,
corrosion and fading.



D | 49860 BKT
Post Light



E | 49861 BKT
Outdoor Ceiling

SURI

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	EXT.	HCWO	NOTES
A	49857	BKT	(1) 60W (M)	5.5W x 11.25H	6.75	---	W
B	49858	BKT	(1) 60W (M)	7.75W x 15.5H	9	---	W
C	49859	BKT	(1) 60W (M)	9W x 17.5H	10.25	---	W
D	49860	BKT	(1) 60W (M)	9W x 20H	---	---	W
E	49861	BKT	(1) 60W (M) ☆	5.5W x 11H	---	---	D

Measurements shown in inches. U.S. & Canada Patent Pending.



Northland™ Outdoor Wall 49776 BK | Page s873

NORTHLAND™

BLACK FINISH WITH INNER WHITE FINISH
ALUMINUM CONSTRUCTION



A | 49775 BK
Outdoor Wall
LE



B | 49776 BK
Outdoor Wall



C | 49777 BK
Outdoor Pendant

NORTHLAND™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	EXT.	HCWO	NOTES
A	49775	BK	(1) 100W (M)	10W x 12H	---	---	---	17.25	3	Ⓜ G Type bulb recommended.
B	49776	BK	(1) 150W (M)	14W x 16.75H	---	---	---	24	4	Ⓜ G Type bulb recommended.
C	49777	BK	(1) 150W (M)	18W x 14.25H	52	67	36	---	---	Ⓜ G Type bulb recommended. Add. chain 4927 BK. Add. stem 2995 BK. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

NORTHLAND™

BRUSHED ALUMINUM FINISH
WITH INNER WHITE FINISH
ALUMINUM CONSTRUCTION



A | 49775 BA
Outdoor Wall
LE



B | 49776 BA
Outdoor Wall
LE



C | 49777 BA
Outdoor Pendant
LE

NORTHLAND™

	ITEM #	FINISH	LIGHT SOURCE	DIMENSIONS	OVRL. H	EXTRA WIRE	CHAIN/ STEM	EXT.	HCWO	NOTES
A	49775	BA	(1) 100W (M)	10W x 12H	---	---	---	17.25	3	W G Type bulb recommended.
B	49776	BA	(1) 150W (M)	14W x 16.75H	---	---	---	24	4	W G Type bulb recommended.
C	49777	BA	(1) 150W (M)	18W x 14.25H	52	67	36	---	---	D G Type bulb recommended. Add. chain 4927 PL. Add. stem 2999 PL. Sloped ceiling kit included.

Measurements shown in inches. U.S. & Canada Patent Pending.

ASHTON LED

TEXTURED BLACK FINISH
WITH WHITE ACRYLIC
ALUMINUM CONSTRUCTION



A | **49798 BKTLED**
Outdoor Wall



B | **49799 BKTLED**
Outdoor Wall



C | **49800 BKTLED**
Outdoor Wall

ASHTON LED

	ITEM #	FINISH	LIGHT SOURCE	LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
A	49798	BKTLED	(1) 12.5W (M)	3000K, 90 CRI, 890 Lumens, 71.2 LPW	5W x 12H	3	6	Ⓜ Dimmable.
B	49799	BKTLED	(1) 40W (M)	3000K, 90 CRI, 2820 Lumens, 68.8 LPW	8.25W x 20H	3	10	Ⓜ Dimmable.
C	49800	BKTLED	(1) 50W (M)	3000K, 90 CRI, 3560 Lumens, 71.2 LPW	10W x 24H	3	12	Ⓜ Dimmable.

Visit kichler.com for recent performance and certification data.

Measurements shown in inches. U.S. & Canada Patent Pending.

ENERGY STAR RATED, HIGH-USE LED

READY FOR ANYTHING

Say goodbye to changing fluorescent lighting tubes. With low-wattage operation and a long-lasting light source, the value of owning LED adds up. Durable, versatile and functional, our high-use LED lights deliver both low-cost operation and superior light output. Every fixture has been tested to ensure it maintains both light performance and a low operating temperature, even in 24/7 applications.



Horizon LED Downlight 43855 WHLED30T | Page s878

FLUSH MOUNT LED

WHITE FINISH WITH ACRYLIC DIFFUSER



A | **10766 WHLED**
ADA Compliant



B | **10767 WHLED**
ADA Compliant



C | **10768 WHLED**
ADA Compliant

FLUSH MOUNT LED

	ITEM #	FINISH	LIGHT SOURCE	*LED OUTPUT	DIMENSIONS	EXT.	HCWO	NOTES
C	10766	WHLED	15W  	3000K, 90 CRI, 1040 Lumens, 70 LPW	10.75W x 3.75H	3.75	5.5	   May be installed on wall or ceiling.
D	10767	WHLED	20W  	3000K, 90 CRI, 1450 Lumens, 73 LPW	13.5W x 3.75H	3.75	6.75	   May be installed on wall or ceiling.
E	10768	WHLED	25W  	3000K, 90 CRI, 1800 Lumens, 72 LPW	16W x 3.75H	3.75	8	   May be installed on wall or ceiling.

*Delivered Lumens shown

Measurements shown in inches. U.S. & Canada Patent Pending.

HORIZON LED DOWNLIGHTS

WHITE FINISH WITH POLYCARBONATE DIFFUSER



A | 43855 WHLED30T 



RETHINK RECESSED.

Designed for new construction, the Horizon LED downlight is an all-in-one, energy efficient fixture – making it an attractive alternative to recessed lighting. The flat, recessed diffuser and sleek half-inch profile deliver even light distribution and a seamless look, while the snap-in, junction box installation provides greater placement flexibility. With fewer components to order and install, Horizon saves time and money at every location.



HORIZON AT A GLANCE:

- Ideal for new construction when specified with a 4" wide x 2-1/8" Square or Octagonal Ceiling Junction box
- Offers the sleek, hidden appeal of a recessed fixture with its 1/2" profile
- Well-dispersed, ambient lighting
- Single fixture to order, track and install
- Simple installation

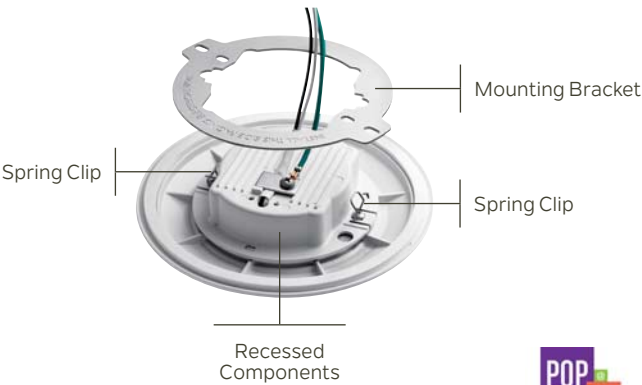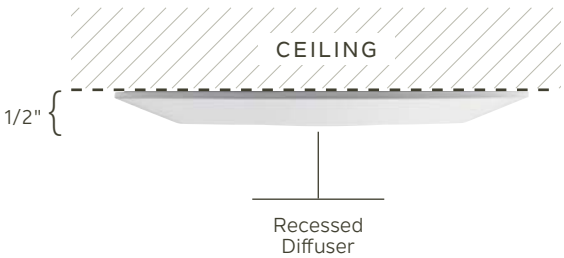

HORIZON LED DOWNLIGHTS

kichler.com/horizon

ITEM #	FINISH	LIGHT SOURCE	*LED OUTPUT	DIMENSIONS	NOTES
A 43855	WHLED30T	12.5W  	3000K, 93 CRI, 850 Lumens, 68 LPW	6.5W x 1.25H	 Use a 4" square or octagon J-box with 2-1/8" min. depth. May be installed on wall or ceiling indoors only. Dimmable.

*Delivered Lumens shown. Measurements shown in inches. U.S. & Canada Patent Pending.

LOW PROFILE LED DOWNLIGHTS GENERATION II

ASSORTED FINISHES WITH POLYCARBONATE DIFFUSER

2700K



A

43848 NILED27
43848 OZLED27
43848 WHLED27



B

43848 NILED27T
43848 OZLED27T
43848 WHLED27T



3000K



C

43848 NILED30
43848 OZLED30
43848 WHLED30



D

43848 NILED30T
43848 OZLED30T
43848 WHLED30T




The Kichler Low Profile LED Downlights – Generation II – feature a 7.5” total diameter to allow for recessed retrofit, but can also install in new construction utilizing any 3” or 4” ceiling J-box. The fixtures feature a domed diffuser to evenly disperse 1000 lumens of light, and extend just 1.25” from the ceiling. Offered in three finishes, these Low Profile LED Downlights are also available in a Title-24 compliant model (identified as those items with the T at the end).

LOW PROFILE LED DOWNLIGHTS GENERATION II AT A GLANCE:

- Rests flush against the ceiling
- J-box installation for new construction
- Retrofit kit available for installation over existing recessed housings

4146 LED RETROFIT FOR 43848

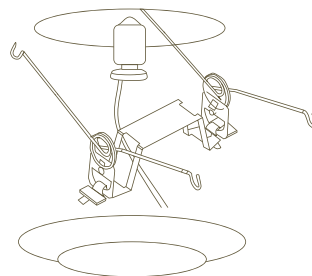

LOW PROFILE LED DOWNLIGHTS - GENERATION II

ITEM #	FINISH	LIGHT SOURCE	*LED OUTPUT	DIMENSIONS	NOTES
A 43848	NILED27, OZLED27, WHLED27	15W	2700K, 90 CRI, 1000 Lumens, 67 LPW	7.5W x 1.25H	Retrofit ceiling adaptor 4146LED. May be installed on wall or ceiling indoors only. Dimmable.
B 43848	NILED27T, OZLED27T, WHLED27T	15W	2700K, 90 CRI, 950 Lumens, 63 LPW	7.5W x 1.25H	Retrofit ceiling adaptor 4146LED. May be installed on wall or ceiling indoors only. Dimmable.
C 43848	NILED30, OZLED30, WHLED30	15W	3000K, 90 CRI, 1000 Lumens, 67 LPW	7.5W x 1.25H	Retrofit ceiling adaptor 4146LED. May be installed on wall or ceiling indoors only. Dimmable.
D 43848	NILED30T, OZLED30T, WHLED30T	15W	3000K, 90 CRI, 950 Lumens, 63 LPW	7.5W x 1.25H	Retrofit ceiling adaptor 4146LED. May be installed on wall or ceiling indoors only. Dimmable.

*Delivered Lumens shown

Measurements shown in inches. U.S. & Canada Patent Pending.

Legend/Symbol Guide

(C)	= Candelabra base lamp (E-12).	D	= Diameter
(C/K)	= Candelabra base lamp (E-12) or Krypton candelabra base lamp.	Ext.	= Extension
(K)	= Krypton candelabra base lamp.	Fluor.	= Fluorescent
(M)	= Medium base lamp (E-26).	H	= Height
(MNCN)	= Mini-can base halogen lamp	HCWO	= Height from Center of Wall Opening
✓	= Fixture requires supply wire rated for at least 75° C.	Incand.	= Incandescent
❖	= Fixture requires supply wire rated for at least 90° C.	L	= Length
☆	= When electrical connection is made inside the fixture, supply wire must be rated at least 75° C. When electrical connection is made in an outlet box, supply wire must be rated at least 60° C.	Overl. H	= Overall Height
①	= Installation Instructions: Fixture must be supported independently of the outlet box unless the outlet box is UL Listed for the weight to be supported. Consult a qualified electrician/installer. Required installation parts included.	W	= Width
		Extra Wire	= Extra wire beyond chain and/or stems
		Chain/Stem	= Length of chain or stem supplied with fixture
		T24	= Title 24 is a document that contains the building codes for the state of California. All lighting fixtures in this catalog that comply with the Jan. 1, 2017 revision of the California Title 24 standards are marked with the T24 logo. For more information, visit www.energy.ca.gov/title24

	= LED Energy Efficient bulb included
	= ADA Compliant
	= CFL Lamp Included
	= DAMP
	= Dark Sky Compliant
	= Incandescent Lamp included
	= Integrated LED
	= Line Extension
	= WET
	= Energy Star
★	= Kichler® Products are not produced or associated with any Native American Indians, nor are they a Native American product or the product of a particular Indian, Indian tribe or Indian arts and crafts organization as defined by 25 U.S.C. §305 et. seq.

- Bulbs not included unless otherwise noted.
- Wattages stated are the maximum recommended; however, you may use lower wattage lamps to suit your lighting needs. Some recommended lamps are not available in the maximum allowable wattage.
- All electrical products are rated as 120-volt, AC unless otherwise noted.
- All electrical products are certified and listed to UL/CSA/ETL Standards for use in U.S.A. and Canada except where noted.
- All products featured in the outdoor section are certified and listed to UL/CSA/ETL standards for wet location except where noted.
- All chain drop products equipped with at least 72" of chain unless otherwise noted.
- Many long life tungsten halogen capsule lamps are now available as alternates to conventional incandescent light bulbs. The halogen capsule lamps may be used to replace any lamp of a higher wattage, but not to exceed the existing specified maximum wattage, i.e., 72W may replace a 75W.
- On some products, in order to accommodate higher-than-normal ceiling height, extra lead wire is supplied and specified. With additional sections of chain or stems (not included), this allows an added measure of design flexibility.
- Finishes for fixtures installed outdoors are subject to change due to prolonged exposure to sunlight, airborne pollutants and other forms of weathering.
- To serve you better, Kichler® reserves the right to make improvements to the products in this catalog. Therefore, some products may change during the life of the catalog and the product information contained in this catalog may also have changed.

Consumer Notice

Federal Legislation to phase out 100 watt Incandescent Bulbs started January 2012

The federal government enacted the Energy Independence and Security Act of 2007 in December 2007, requiring all general-purpose light bulbs that produce 310–2600 lumens of light be 30% more energy efficient (similar to current halogen lamps) than current incandescent bulbs by 2014. The efficiency standards started with 100 watt bulbs in January 2012 and will end with 40 watt bulbs in January 2014.

Light bulbs outside of this range are exempt from the restrictions (historically, less than 40 watts or more than 150 watts). Also exempt

are several classes of specialty lights, including appliance lamps, rough service bulbs, 3-way, colored lamps and plant lights.

By 2020, a second tier of restrictions would become effective; which requires all general-purpose bulbs to produce at least 45 lumens per watt (similar to current CFLs). Exempt from the Act are reflector flood, 3-way, candelabra, colored and other specialty bulbs.

Many governments worldwide have passed measures to prohibit the sale of incandescent light bulbs for general lighting. The aim is to encourage use of more energy-efficient lighting alternatives, such as compact fluorescent lamps (CFLs) and LED lamps.

References: www.energy.senate.gov

We go to great lengths to assure the metal and glass finishes shown in the catalog match the actual products, but printing variations and variations in chemical finishes and the nature of hand-applied finishing will cause some differences between the printed images and actual product, and from one product to another.

We use only non-ferrous materials on the exterior parts of our outdoor lantern products, and use the best available weather-resistant finishes. However, due to some extreme environmental conditions such as acid rain, salt air and ultraviolet exposure, we cannot guarantee our exterior finishes, with the exception of our LifeBrite® lanterns.

Due to environmental conditions such as soil acidity, concrete alkalinity and other corrosive soil and air conditions, we cannot guarantee our direct burial posts.

Abbreviation Key

AB	Antique Brass	NBR	Natural Brass
ABZ	Antique Bronze	NCH	Brushed Nickel & Polished Chrome
ACK	Antique Crackle™	NCHB	Brushed Nickel and Polished Chrome with Black
ADC	Adobe Cream™	NI	Brushed Nickel
AGZ	Aged Bronze	NIA	Brushed Nickel with Alabaster Swirl Glass
AGZS	Aged Bronze with Satin-Etched Cased Opal Glass	NIS	Brushed Nickel with Satin-Etched Glass
ANO	Art Nouveau Bronze	NISW	Brushed Nickel with Satin-Etched White Glass
AP	Antique Pewter	NIW	Brushed Nickel with Satin-Etched White Glass
AVI	Anvil Iron	OAU	Oldie Auburn™
AZ	Architectural Bronze™	OB	Oldie Brick®
AZT	Textured Architectural Bronze™	OBG	Oldie Brushed Bronze™
BA	Brushed Aluminum	OI	Oldie Iron
BAW	Brushed Aluminum with Wood Trim	OLZ	Oiled Bronze
BAB	Burnished Antique Brass	OMC	Oldie Mill Copper™
BBZ	Burnished Bronze™	OZ	Oldie Bronze®
BCZ	Burnished Copper Bronze	OZS	Oldie Bronze® with Satin-Etched Glass
BGN	Burnished Granite™	OZSW	Oldie Bronze® with Satin-Etched White Glass
BH	Buckhorn™	OZU	Oldie Bronze® with UMBER Glass
BK	Black	OZW	Oldie Bronze® with Satin-Etched White Glass
BKG	Black with Gold Highlights	PB	Polished Brass
BKN	Black Nickel	PBC	Polished Brass with Chrome
BKS	Black with Satin-Etched Glass	PC	Polished Chrome
BKZ	Berkshire Bronze™	PGR	Pebbled Granite™
BKN	Black Nickel	PN	Polished Nickel
BMB	Brushed Modern Bronze	PPW	Polished Pewter
BPT	Brushed Pewter	PR	Prairie Rock™
BRL	Brûlée™	PRZ	Parisian Bronze™
BRZ	Brushed Bronze	PSS316	Polished Stainless Steel Marine Grade
BS	Burnished Silver	PZ	Patina Bronze
BSG	Burnished Silver and Gold	RBZ	Royal Bronze
BST	Brown Stone	RNX	Rubbed Onyx
BZ	Bronze	RST	Rustic™
CH	Polished Chrome	RVN	Ravenna™
CHW	Polished Chrome with Satin-Etched White Glass	RZ	Rubbed Bronze™
CLP	Classic Pewter	RZS	Rubbed Bronze™ with Satin-Etched Glass
CLR	Clear	SC	Stucco White
CMB	Cambridge	SCK	Seine Crackle™
CMZ	Cambridge Bronze	SEG	Satin-Etched Glass
CP	Champagne	SGE	Sage
CPBG	Champagne and Brushed Gold	SI	Silver
CSH	Cashmere™	SIL	Silver Leaf
CST	Canyon Slate™	SN	Satin Nickel
CTZ	Colton Bronze™	SRM	Sunrise Mist™
CV	Canyon View™	SS	Stainless Steel
CZ	Carré Bronze®	SWZ	Shadow Bronze™
DBK	Distressed Black	SZ	Sedona Bronze™
DBR	Distressed Brass	TRZ	Terrene Bronze™
DCO	Distressed Copper	TZ	Tannery Bronze™
DZ	Dore Bronze™	TZG	Tannery Bronze™ with Gold
FDS	Feldspar™	TZP	Tannery Bronze™ with Polished Brass Accents
FZ	Franciscan Bronze™	VNB	Vintage Natural Brass™
GBR	Golden Brûlée™	WBR	Wispy Brûlée
GD	Gold	WCP	Weathered Copper
GNT	Granite	WSP	Weathered Steel
GST	Galvanized Steel	WH	White
HB	Heritage Bronze™		
LBZ	Lincoln Bronze™		
LD	Londonderry™		
LED	Light Emitting Diode		
LZ	Legacy Bronze™		
LZG	Legacy Bronze™ with Gold Accents		
MBZ	Marbled Bronze		
MCH	Midnight Chrome		
MIZ	Mission Bronze™		
MPC	Mottled Pecan™		
MUL	Multicolor		

Accessories

Standard Gauge Chain

Chain may be ordered in 3' lengths to supplement existing chain supplied with Kichler® fixtures. To order additional chain, look for the chain recommendations listed for fixtures requiring chain.

2996 AP Antique Pewter
2996 AVI Anvil Iron
2996 BRSG Brushed Silver and Gold
2996 BZ Bronze
2996 CH Chrome
2996 CLP Classic Pewter
2996 DAW Distressed Antique White
2996 DBK Distressed Black
2996 NBR Natural Brass
2996 NI Brushed Nickel
2996 OZ Olde Bronze®
2996 PN Polished Nickel
2996 RT Rust
2996 SGD Sterling Gold
2996 SIL Silver Leaf
2996 SWZ Shadow Bronze™
2996 WZC Weathered Zinc

Outdoor Solid Brass Chain

4927 AZ Architectural Bronze
4927 BK Black
4927 OZ Olde Bronze®
4927 WZC Weathered Zinc

Stem Segments

To increase the fixture overall length to a maximum of 5-stem segments you may order:

12" Length

2995 AP Antique Pewter
2995 BK Black
2995 CH Chrome
2995 OZ Olde Bronze®
2999 AP Antique Pewter
2999 AVI Anvil Iron
2999 AZ Architectural Bronze™
2999 BK Black
2999 BRSG Brushed Silver and Gold
2999 CH Chrome
2999 CLP Classic Pewter
2999 DAW Distressed Antique White
2999 NBR Natural Brass
2999 NI Brushed Nickel
2999 OZ Olde Bronze®
2999 PL Platinum
2999 PN Polished Nickel
2999 RT Rust
2999 SGD Sterling Gold
2999 SIL Silver Leaf
2999 SWZ Shadow Bronze
2999 WH White
2999 WZC Weathered Zinc
4935 AP Antique Pewter
4935 CH Chrome
4935 CLP Classic Pewter
4935 CYZ Cayman Bronze™
4935 DAW Distressed Antique White
4935 DBK Distressed Black
4935 NI Brushed Nickel
4935 OZ Olde Bronze®
4935 PN Polished Nickel
4935 RT Rust
4935 SWZ Shadow Bronze®
4935 WMZ Warm Bronze
4935 WZC Weathered Zinc

24" Length

2997 NI Brushed Nickel

36" Length

3036 NI Brushed Nickel

48" Length

3048 NI Brushed Nickel

Heavy Gauge Chain

4901 ACO Antique Copper
4901 AVI Anvil Iron
4901 BRSG Brushed Silver and Gold
4901 CH Chrome
4901 CYZ Cayman Bronze™
4901 DAW Distressed Antique White
4901 DBK Distressed Black
4901 NI Brushed Nickel
4901 OZ Olde Bronze®
4901 PN Polished Nickel
4901 SGD Sterling Gold
4901 WZC Weathered Zinc
4907 PN Polished Nickel
4908 CLP Classic Pewter
4908 NI Brushed Nickel
4908 OZ Olde Bronze®
4908 PN Polished Nickel
4908 SGD Sterling Gold

Halogen & Krypton Lamps

PRODUCT ID	DESCRIPTION
5901 CLR	Clear 50W T-3 Double Contact, Bayonet Base, Tungsten (Suitable for use with all Kichler® lights requiring Halogen Lamps)
5902 FST	Frosted 50W GU10 Halogen Lamp
5903 CLR	Clear 100W T-3 Mini-Can Base, Tungsten Halogen Lamp
5904 CLR	Clear 20W T-3 Candelabra Base Krypton Lamp
5904 FST	Frosted 20W T-3 Candelabra Base Krypton Lamp
5905 CLR	Clear 60W T-3 Candelabra Base Krypton Lamp

Decorative Light Bulbs




5971 CLR
40W (C)

4058 CLR
40W (C)

4071 CLR
60W (M)

PRODUCT ID	DESCRIPTION
4058 CLR	40W Candelabra Base Vintage Filament Bulb, Amber Tint
4071 CLR	60W Medium Base Vintage Filament Bulb
5905 FST	Frosted 60W T-3 Candelabra Base Krypton Lamp
5907 CLR	Clear 40W T-3 Candelabra Base Krypton Lamp
5907 FST	Frosted 40W T-3 Candelabra Base Krypton Lamp
5908 FST	Frosted 60W G9 Halogen Lamp
5909	50W MR16 Shielded GU10 Lamp
5910 CLR	Clear 75W T-3 Mini-Can Base, Tungsten Halogen Lamp
5971 CLR	40W Candelabra Base Vintage Filament Bulb

Low Profile LED Downlight Generation II Retrofit Can Kit

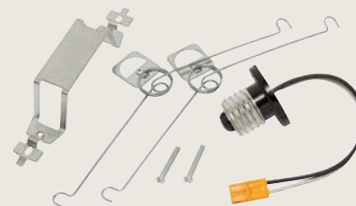

4146 LED

Index

6520 OZ..... 850	43154 AP 841	43848 OZLED30T 879	45685 NBRLED 861
	43154 MIZ 843	43848 WHLED27 879	45685 PNLED 860
10766 WHLED..... 877	43194 AP 841	43848 WHLED27T 879	45686 NBRLED 851, 861
10767 WHLED 877	43194 MIZ 843	43848 WHLED30 879	45686 PNLED 851, 860
10768 WHLED..... 877	43457 CLP..... 824	43848 WHLED30T..... 879	
	43457 OZ 826	43855 WHLED30T 878	49473 RZLED 869
42124 CLP 820	43712 PN 830	43895 OZ..... 819	49500 BKTLED 867
42124 OZ 821	43713 PN..... 831	43896 OZ..... 818	49775 BA 874
42125 CLP..... 820	43715 PN 831	43898 OZ..... 819	49775 BK 873
42125 OZ 821	43716 PN 831, 850	43953 NI 847	49776 BA 874
42126 CLP..... 820, 850	43722 PN..... 830	43953 OZ 846	49776 BK 873
42126 OZ 821, 850	43723 CH..... 834	43954 NI 847	49777 BA 874
	43723 ESP..... 836	43954 OZ..... 846	49777 BK 873
43057 CLP 825	43724 CH..... 835	43955 NI 847	49798 BKTLED 875
43057 OZ..... 827	43724 ESP..... 837	43955 OZ 846	49799 BKTLED 875
43058 CLP..... 825	43725 CH..... 835	44015 WZC 849	49800 BKTLED 875
43058 OZ 827	43725 ESP 837		49857 BKT 870
43059 CLP 824	43726 CH..... 835	45449 AP..... 841, 851, 862	49858 BKT 870
43059 OZ..... 826	43726 ESP 837	45449 MIZ..... 843, 851, 863	49859 BKT 870
43060 CLP..... 825	43727 CH..... 835, 851	45450 AP 862	49860 BKT 871
43060 OZ 827	43727 ESP..... 837, 851	45450 MIZ..... 863	49861 BKT..... 871
43139 AP..... 841	43758 CH..... 834	45451 AP 862	
43139 MIZ..... 843	43758 ESP..... 836	45451 MIZ..... 863	
43149 AP 839	43793 BK 815	45452 AP..... 862	
43149 MIZ..... 842	43794 BK 815	45452 MIZ..... 863	
43150 AP 839	43795 BK 814	45457 CLP 825, 850	
43150 MIZ 842	43848 NILED27 879	45457 OZ 827, 850	
43151 AP 840	43848 NILED27T 879	45679 CHLED 857	
43151 MIZ 842	43848 NILED30..... 879	45679 NILED 856	
43152 AP 841	43848 NILED30T 879	45680 CHLED 857	
43152 MIZ 843	43848 OZLED27..... 879	45680 NILED 856	
43153 AP..... 841	43848 OZLED27T 879	45682 CHLED..... 855	
43153 MIZ..... 843	43848 OZLED30 879	45683 CHLED..... 855	

KICHLER

 
7711 E. Pleasant Valley Rd.
PO Box 318010
Cleveland, Ohio 44131-8010

CONNECT WITH US



Like us on Facebook: facebook.com/Kichler.Lighting
Follow us on twitter: twitter.com/kichlerlight
Watch us on YouTube: youtube.com/KichlerLighting
Join us on Houzz: houzz.com/pro/kichlerlighting/kichler
Find us on Pinterest: pinterest.com/kichlerstyle







Featured on Front Cover:
Aberdeen Collection
Chandelier 43895 OZ, page s819

Featured on Back Cover:
Lyndon Collection
Portable Lantern
49500BKTLED, page s867

KICHLER

GET INSPIRED AT
KICHLER.COM
For more information call
866.558.5706

Catalog No. K617
www.KICHLER.com
Printed in USA
16KD4541-35M
© The L.D. Kichler Co. All rights reserved.
Kichler® The majority of newer Kichler fixtures
are U.S. and Canadian Patent Pending.