
dweLED

by WAC Lighting

2018 Introduction



dweLED

by WAC Lighting

LED Bath & Sconce.....	2-25
LED Sconces + Swing Arms.....	26-29
LED Pendants + Chandeliers.....	30-57
LED Ceiling Mounts.....	58-63
LED Outdoor.....	64-79

Wand

31" and 38" LED Bath & Sconce

 


Add sparkle to your sanctuary with this exciting bath design, featuring miniature crystal beads that shimmer with light. It's a luxe touch, and energy-efficient too, thanks to state-of-the-art LED modules within.

Color Temp: 3000K
CRI: 90
Dimming (120V): 100%–10% 0–10V;
 100%–5% ELV & Triac
Rated Life: 60,000 hours
Input: 120–277V



- Acrylic tube filled with crystalline beads
- Can be mounted vertically or horizontally
- **3" x 1.25" x 1.13" universal voltage driver (120V-220V-277V) installs within a junction box**
- ADA compliant



	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-19831	31"	8W	845	584	CH Chrome
WS-19838	38"	11W	1163	854	

Example: **WS-19831-CH**

Wand



WS-19831-CH shown




Trio

20", 28" and 37" LED Bath & Sconce



A subtly retro-inspired piece that's totally modern at the same time, Trio's evenly illuminated strips hover above a polished chrome backplate, creating an interesting yet understated accent in blissful bathrooms and commercial spas alike. Mount it over a vanity or vertically as a sconce.

Color Temp: 3000K
CRI: 90
Dimming: 100%–5% ELV;
 100%–1% 0–10V
Rated Life: 75,000 hours
Input: 120–277V

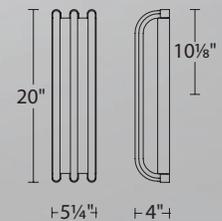

WS-51820



WS-51828




WS-51837

- Three individual illuminating chrome plated elements
- **Universal voltage driver (120V-220V-277V) concealed within fixture**
- ADA compliant

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-51820	20"	20W	1522	1061	CH Chrome
WS-51828	28"	27W	2602	1821	
WS-51837	37"	34W	3351	2346	

Example: **WS-51828-CH**

Trio

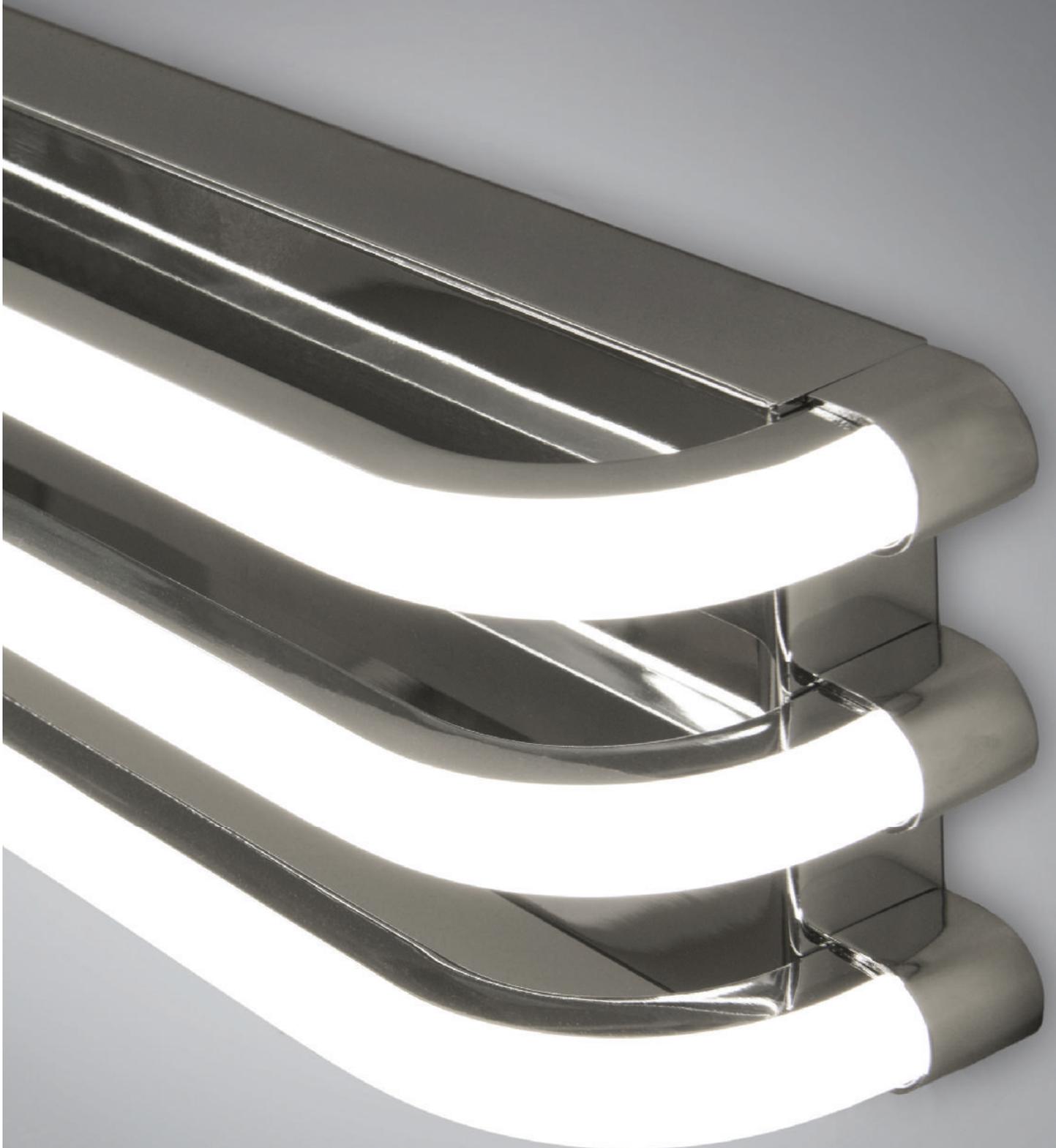

WS-51837-CH shown

 
Endure

20", 27" and 37" LED Bath & Sconce




Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 83,000 hours
Input: 120–277V

- Frosted edge-lit acrylic diffuser
- Can be mounted vertically or horizontally
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**
- ADA compliant



WS-53820

 

WS-53827



WS-53837

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-53820	20"	20W	879	703	WT White 
WS-53827	27"	25W	1384	1107	
WS-53837	37"	30W	2040	1632	

Example: **WS-53827-WT**

Endure




WS-53827-WT shown

A continuous band of even light wraps around a finely crafted aluminum structure like the Roman "Circus Maximus." Hollow in the center, this elegant family of sconces and vanities exhibits a refreshing combination of technology and modernity.

Wedge


18" LED Bath & Sconce

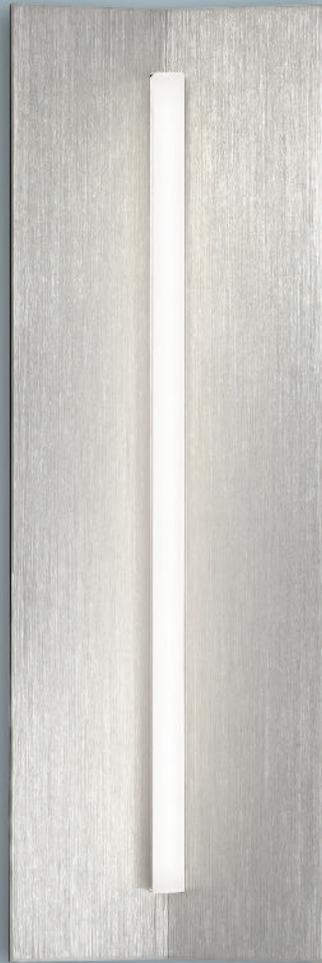

A thin illuminated blade bisects a bent aluminum plate, suggesting kinetic energy and symmetry at the point of light.
A clean, geometric design, Wedge works horizontally, vertically, or in a patterned display.

Color Temp: 3000K
CRI: 90
Dimming: 100%–5% ELV, 0-10V
Rated Life: 50,000 hours
Input: 120V

- Brushed aluminum frosted edge-lit acrylic diffuser
- Can be mounted vertically, horizontally, at an angle or on ceiling
- **3" x 1.25" x 1.13" driver installs within junction box**
- ADA compliant

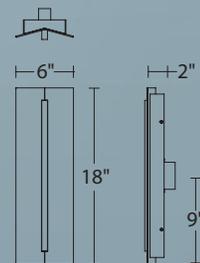

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-75818	18"	9W	535	417	AL Brushed Aluminum 

Example: **WS-75818-AL**

Wedge



Level

19", 25" and 37" LED Bath & Sconce


Now available in white



Adjustable backplate

Color Temp: 3500K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 85,000 hours
Input: 120–277V

- Half-inch edge-lit linear blade
- Frosted diffuser provides even illumination
- Adjustable back plate (see spec sheet for adjustable length)
- Conversion plate for 4" junction box included
- Can be mounted vertically or horizontally
- 19" version is ADA compliant
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**

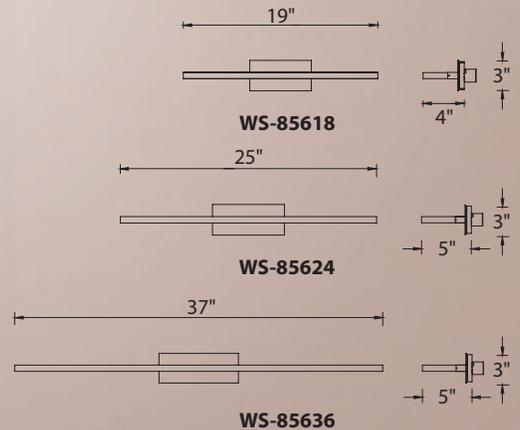

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-85618	19"	15W	1300	865	WT White AL Brushed Aluminum <div style="display: inline-block; width: 20px; height: 10px; background-color: #cccccc; margin-right: 5px;"></div> NEW
WS-85624	25"	20W	1735	1255	
WS-85636	37"	30W	2561	1800	

Example: **WS-85618-WT**

Verge

25" and 37" LED Bath



A vertical version of our handsome Level sconce, Verge features an ultra-thin frosted diffuser that helps to spread light evenly without any glare or hot spots.



Color Temp: 3500K
CRI: 90
Dimming: 100%–5% ELV
Rated Life: 54,000 hours
Input: 120–277V

- Half-inch frosted acrylic linear blade
- Edge-lit LED modules give an ambient effect
- Can be mounted up or down
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**
- ADA compliant



WS-17825



WS-17837

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-17825	25"	20W	1180	1047	AL <i>Brushed Aluminum</i> WT <i>White</i> 
WS-17837	37"	30W	1809	1460	

Example: **WS-17825-WT**

Line

 
18", 24" and 36" LED Bath & Sconce

Now available in brushed black



Uber-thin edge-lit LED panels provide a downward task light free of any hot spots as well as an upward ambient illumination. Even better, the design can be rotated around to provide direct or indirect illumination as the needs arise when installed in a bath.


Color Temp: 2700K, 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 80,000 hours
Input: 120V (277V special order)



WS-6718



 WS-6724



WS-6736

- Ultra-thin light-extraction panel and edge-lit acrylic diffuser
- Adjust rotating panel for indirect, up, down or task lighting
- Can be mounted vertically or horizontally
- 2" x 1.38" x 1.02" transformer installs within junction box


Line



	Size	Watt	Color Temp	LED Lumens	Delivered Lumens	Finish
WS-6718-27	18"	16W	2700K	1004	770	
WS-6718-30			3000K	1109	850	
WS-6724-27	24"	22W	2700K	1339	1035	BK <i>Brushed Black</i> NEW
WS-6724-30			3000K	1478	1140	
WS-6736-27	36"	29W	2700K	2009	1380	
WS-6736-30			3000K	2218	1520	

Example: **WS-6718-30-BK**

For 277V, add an "F" before the finish: **WS-6718F-30-BK**

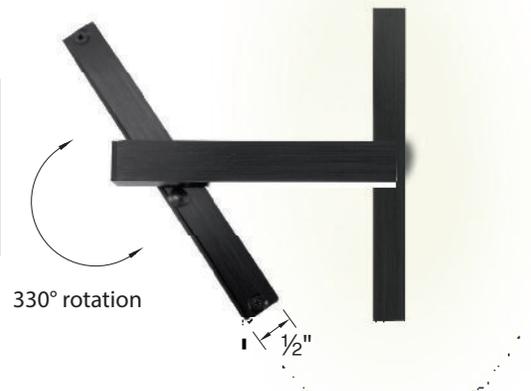


Nightstick

19", 25", 37", 49", 61", 73" and 97" LED Wall & Ceiling

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 54,000 hours
Input: 120V

 - Co-extruded acrylic diffuser
- Available in multiple sizes to meet numerous applications
- Decorative plate to cover up to a standard 4" junction box is included
- Can be mounted vertically, horizontally, at an angle or on ceiling
- Specially rated for installation in the storage area of a clothes closet
- No transformer or driver needed
- ADA compliant



19" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35819



25" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35825



 
37" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35837



49" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35849



61" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35861



73" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35873




97" $2 \frac{1}{16}"$
 $1 \frac{5}{16}"$
WS-35897


Nightstick





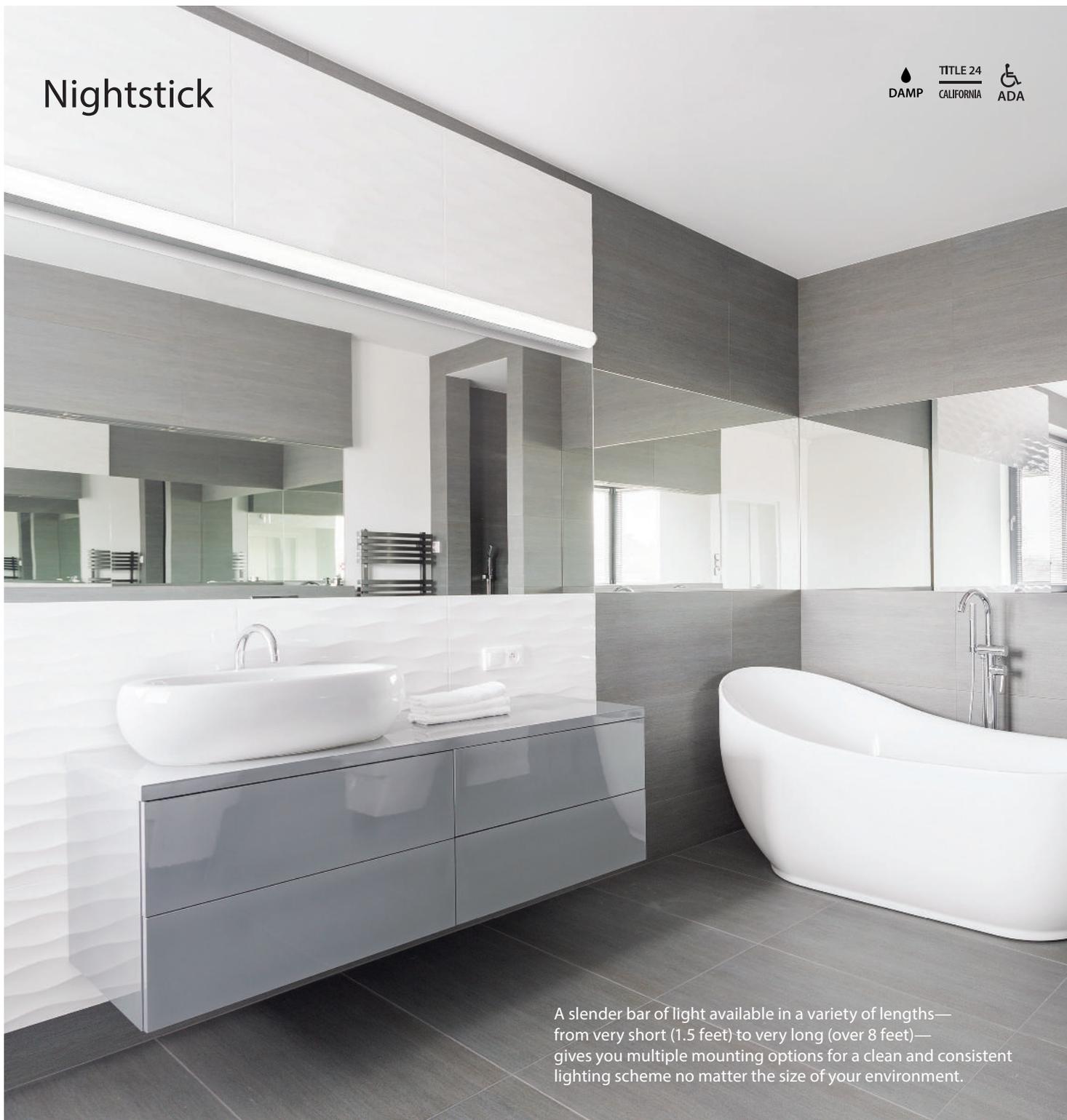

 A slender bar of light available in a variety of lengths— from very short (1.5 feet) to very long (over 8 feet)— gives you multiple mounting options for a clean and consistent lighting scheme no matter the size of your environment.

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-35819	19"	17W	1276	957	WT White AL Brushed Aluminum  
WS-35825	25"	22W	1708	1324	
WS-35837	37"	34W	2585	2014	
WS-35849	49"	44W	3399	2617	
WS-35861	61"	53W	4213	3244	
WS-35873	73"	64W	4912	3782	
WS-35897	97"	84W	6458	4973	

Example: **WS-35861-AL**

Brink

 
 
 
 
12", 18", 24" and 36" LED Bath & Sconce


Now available in brushed brass



Color Temp: 2700K, 3000K, 3500K
CRI: 90
Dimming: 100%–5% ELV
Rated Life: 85,000 hours
Input: 120–277V

- Co-extruded acrylic diffuser
- Conversion plate for 4" junction box included
- Can be mounted vertically, horizontally or at an angle
- Adjustable backplate
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**
- ADA compliant



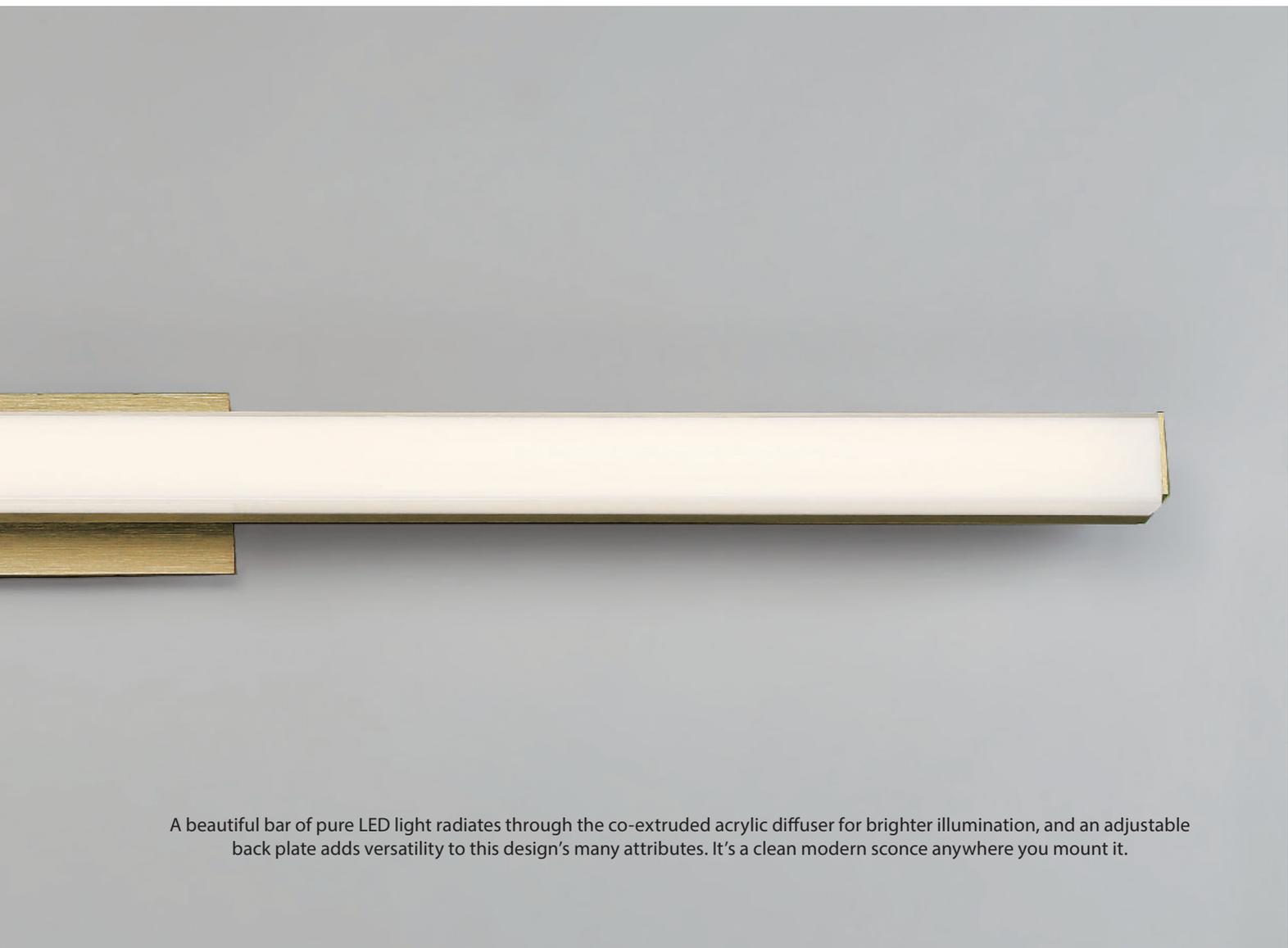

A beautiful bar of pure LED light radiates through the co-extruded acrylic diffuser for brighter illumination, and an adjustable back plate adds versatility to this design's many attributes. It's a clean modern sconce anywhere you mount it.

	Size	Color Temp	Watt	LED Lumens	Delivered Lumens	Finish
WS-77612-27	12"	2700K	10W	863	741	AL <i>Brushed Aluminum</i> BR <i>Brushed Brass</i>  NEW
WS-77612-30		3000K	10W	905	767	
WS-77612-35"		3500K	10W	935	803	
WS-77618-27	18"	2700K	15W	1155	910	
WS-77618-30		3000K	15W	1225	1015	
WS-77618-35		3500K	15W	1330	1115	
WS-77624-27	24"	2700K	20W	1595	1330	
WS-77624-30		3000K	20W	1720	1440	
WS-77624-35		3500K	20W	1785	1510	
WS-77636-27	36"	2700K	30W	2365	1985	
WS-77636-30		3000K	30W	2445	2095	
WS-77636-35		3500K	30W	2561	2180	

Example: **WS-77636-30-BR**

Ratio

 
20", 30" and 40" LED Bath & Sconce

DAMP TITLE 24 CALIFORNIA ADA




Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV
 Rated Life: 54,000 hours
 Input: 120V (277V special order)


- Co-extruded acrylic diffuser
- Perfectly even illumination end to end
- No transformer or driver needed
- ADA compliant



WS-99820

 

WS-99830

 

WS-99840

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-99820	20"	22W	1880	975	CH <i>Chrome</i> 
WS-99830	30"	28W	2583	1371	
WS-99840	40"	36W	3100	1780	

Example: **WS-99830-CH**
 For 277V special order, add an "F" before the finish: **WS-99830F-CH**

Ratio



A thin band of chrome divides the light into even sections on this simple, sophisticated sconce, a reliable design full of bright, energy-efficient light perfect for both commercial and residential applications.

Bliss

22", 28" and 36" LED Bath

Now available in 28"



TITLE 24
CALIFORNIA



Color Temp: 3000K (2700K / 3500K Special Order)


CRI: 90

Dimming: 100%–10% ELV

Rated Life: 50,000 hours*

Input 120V (277V special order)

- Mitered glass diffuser with silk-screen ceramic interior
- Conversion plate for 4" junction box included
- Can be mounted vertically and horizontally
- No transformer or driver needed
- ADA compliant

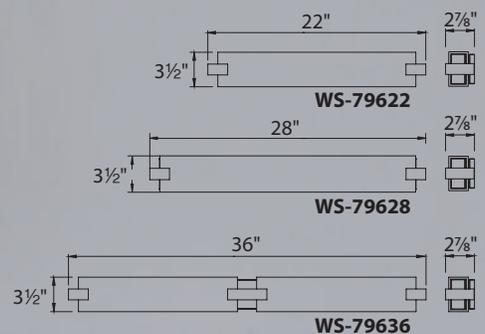

NEW

	Size	Watt	LED Lumens	Delivered Lumens	Finish	
	WS-79622	22"	25W	2390	1646	PN Polished Nickel 
	WS-79628	28"	35W	3433	2333	
	WS-79636	36"	39W	3472	2540	

Example: **WS-79628-PN**

For 277V special order, add an "F" before the finish: **WS-79622F-PN**

For 2700K add "-27", 3500K add "-35" before finish: **WS-79622-35-PN**


Bliss




Two polished nickel clips gently restrain the tempered, mitered glass diffuser at its edges in an elegant meditation on balance, while highly efficient LED modules ensure an outstanding illumination that will endure the test of time.

Esprit


15", 26" and 38" LED Bath or Sconce

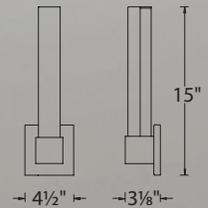

WS-69815

 

WS-69826

 

WS-69838

Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV
 Rated Life: 50,000 hours*
 Input: 120–277V

- Etched acrylic diffuser
- LED modules positioned closer to diffuser for broader spread of illumination
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**
- ADA compliant

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-69815	15"	10W	845	636	BN <i>Brushed Nickel</i> 
WS-69826	26"	20W	1784	1240	
WS-69838	38"	30W	2712	2136	

Example: **WS-69826-BN**

Esprit

With high-performance LED modules positioned closer to the diffuser, Esprit delivers a wider illumination that's perfect for fine bathrooms at luxury homes, hotels, restaurants and office buildings, all while maintaining a slim, geometric profile.

Elementum

13", 22" and 30" LED Bath or Sconce

Now available in brushed brass



Color Temp: 2700K (3000K & 3500K Special Order)


CRI: 90

Dimming: 100%–10% ELV


Rated Life: 54,000 hours

Input: 120V (277V special order)


- Opal glass diffuser
- 22" and 30" versions may be mounted vertically or horizontally
- No transformer or driver needed
- ADA compliant

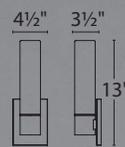

WS-7213

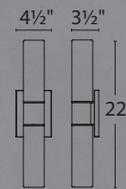

WS-7222

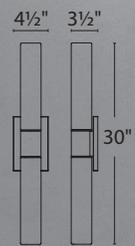

WS-7230

Elementum



Updated with a warm brass finish, Elementum brings unparalleled task lighting into your bathroom, whether mounted vertically on either side of the mirror or above a vanity mirror for a flattering diffuse illumination.

	Size	Watt	LED Lumens	Delivered Lumens	Finish
WS-7213	13"	13W	1118	856	BR <i>Brushed Brass</i> BN <i>Brushed Nickel</i> CH <i>Chrome</i> 
WS-7222	22"	26W	2119	1559	
WS-7230	30"	31W	2404	1708	

NEW

Example: **WS-7222-BR**

For 277V special order, add an "F" before the finish: **WS-7222F-BR**

For 3000K add "-30", 3500K add "-35" before finish: **WS-7230-35-CH**

Stretch



Fingertip-touch dimming and cutting-edge LED technology give the bedside lamp a much-needed upgrade.
Flexible arms allow for customizable angles and task-oriented applications.
Available now with one or two arms and approved for mounting in any orientation.

Stretch


LED Swing Arm

Now available in 2 lights & titanium



Color Temp: 3000K
CRI: 90
Dimming: Internal
Rated Life: 50,000 hours
Input: 120V

- A contemporary utilitarian design
- Flexible, yet fixable rubber tube for directing light
- Fingertip touch dimming on back plate
- Individually switched
- Two 12" cord covers, and 8ft cord for hardwired or portable installation
- Installs on a standard 2" x 4" junction box
- Conversion plate for 4" junction box included
- Driver located within canopy

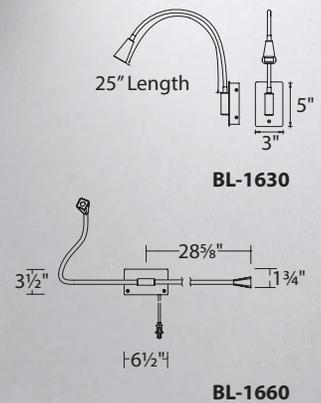

	No. of Lights	Watt	LED Lumens	Delivered Lumens	Finish
NEW BL-1660	2	17W	660	535	WT White BK Black TT Titanium
BL-1630	1	8W	489	260	NEW

Example: **BL-1660-BK**

Bossa Nova

LED Wall Sconce




WS-93801-BK shown

With its contrast of simple shapes, Bossa Nova captures the formal energy of Mid-Century modernism, but adds a high-tech twist with cutting-edge LED light and an installation-friendly design.

Color Temp: 3000K
CRI: 90
Dimming: 100%–5% ELV;
100%–3% 0–10V
Rated Life: 50,000 hours
Input: 120V

- Mouth-blown opal glass shades
- Driver located in fixture

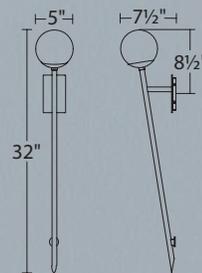


WS-93801

Bossa Nova

LED Wall Sconce

 **TITLE 24**
CALIFORNIA

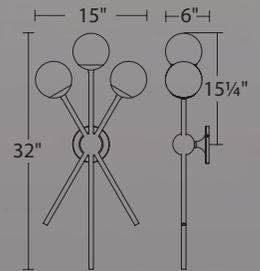


WS-93803

	No. of Lights	Watt	LED Lumens	Delivered Lumens	Finish
WS-93801	1	6W	400	300	BK <i>Black</i> 
WS-93803	3	12W	869	681	

Example: **WS-93803-BK**


Bossa Nova

38" and 54" LED Chandeliers

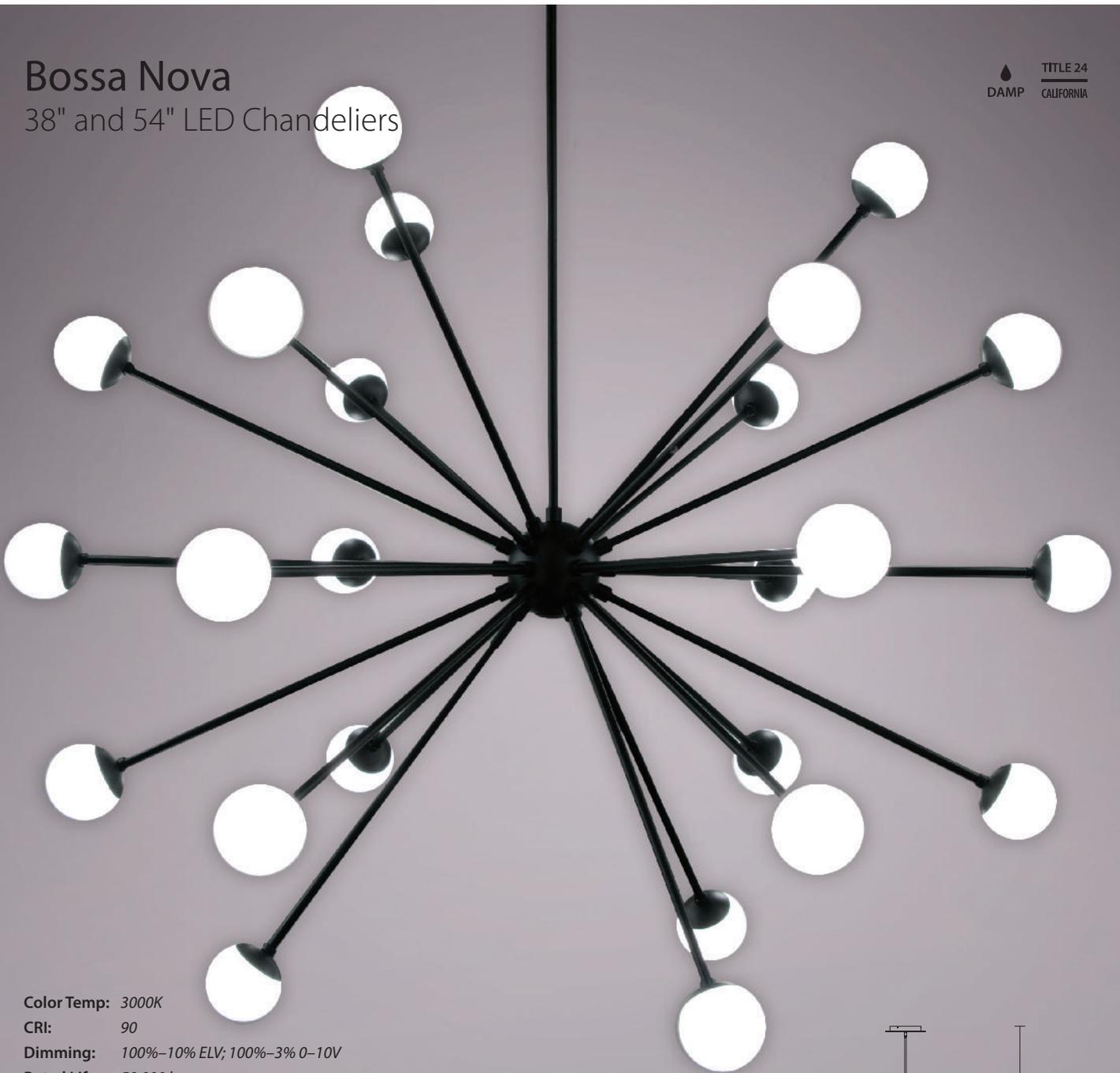

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV; 100%–3% 0–10V
Rated Life: 50,000 hours
Input: 120–277V

- Mouth-blown opal glass shades
- Easy-to-assemble design with quick connections
- Three 12" and one 6" downrod included
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within fixture**

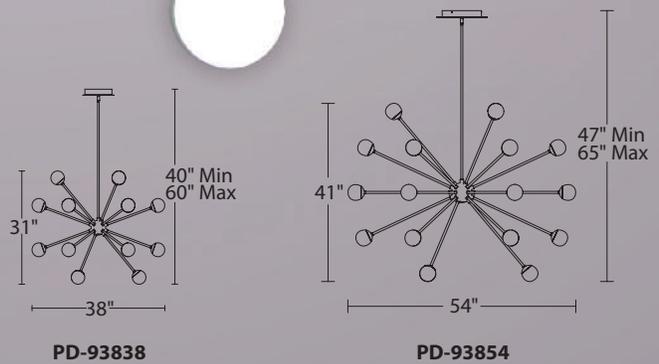

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-93838	38"	65W	5389	4670	BK <i>Black</i> 
PD-93854	54"	87W	7394	6158	

Example: **PD-93854-BK**




PD-93838-BK shown

Bossa Nova

34" and 44" LED Chandeliers

PD-93844-BK shown

With its contrast of simple shapes, Bossa Nova captures the formal energy of Mid-Century modernism, but adds a high-tech twist with cutting-edge LED light and an installation-friendly design.

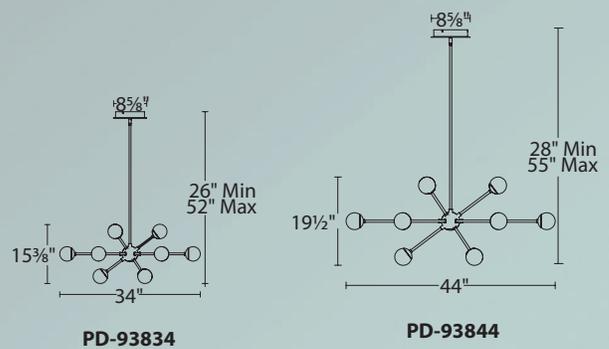

Bossa Nova

DAMP TITLE 24
CALIFORNIA



Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV; 100%–3% 0–10V
 Rated Life: 50,000 hours
 Input: 120–277V

- Mouth-blown opal glass
- Easy-to-assemble design with quick connections
- Interchangeable rods are varied in length for customization
- Three 12" and one 6" downrod included
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within fixture**


	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-93834	34"	44.3W	3492	2969	BK Black 
PD-93844	44"	43.2W	4110	3121	

Example: **PD-93834-BK**

Omega

28" LED Pendant


 **TITLE 24**
CALIFORNIA

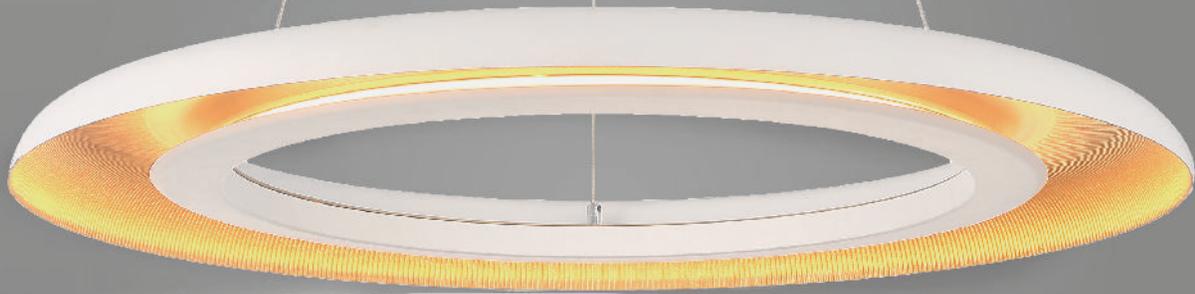

Modern matte finishes and a lustrous contrast of intricate gold ridges give this simple form an understated complexity, while energy efficient LED modules radiate with pure, even, indirect light.

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV, 100%–15% 0–10V
Rated Life: 50,000 hours*
Input: 120–277V

- Thin powered aircraft cables provide an ultra-clean look
- Hidden LED modules point at contrast ridges and reflect light downward for broad, even illumination
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

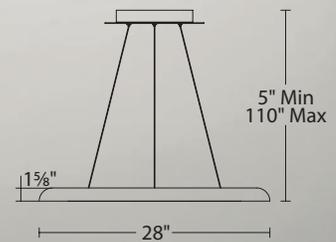


PD-21828

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-21828	28"	33W	2426	864	BK/GR <i>Black/Gold Ribbed</i> WT/GR <i>White/Gold Ribbed</i> 

Example: **PD-21828-WT/GR**

Omega

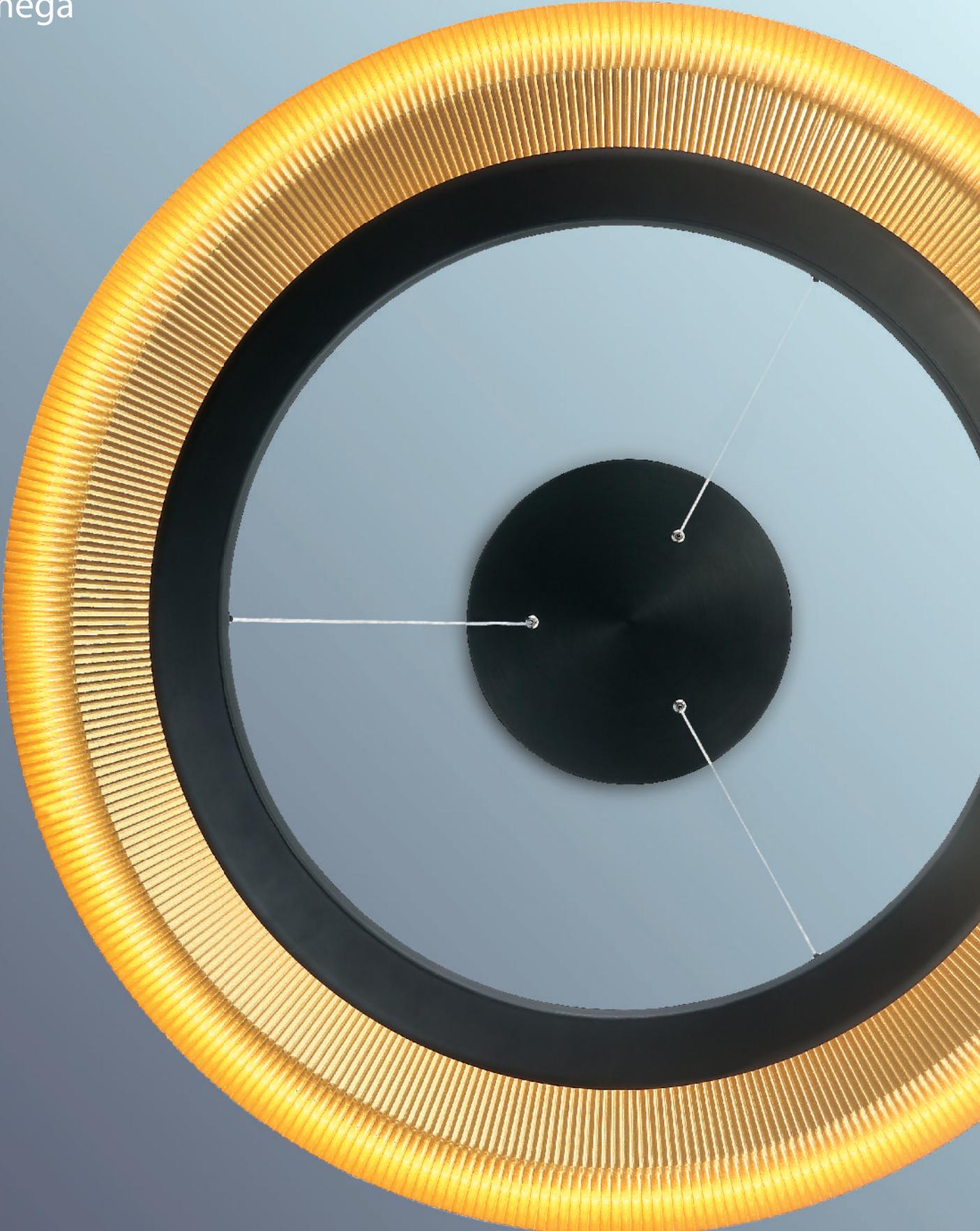


Corso


18", 32" and 43" LED Pendant
Now available in black and white



 
PD-33732-BK shown



PD-33718

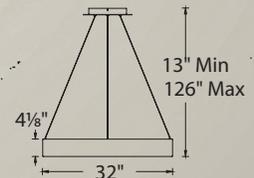

PD-33732

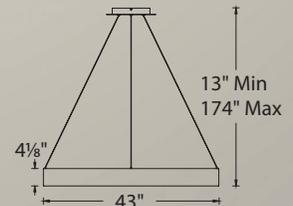

PD-33743

Color Temp: 3000K
CRI: 80
Dimming: 100%-5% ELV;
0-10V
Rated Life: 83,000 hours
Input: 120-277V

- Aluminum hardware, PC diffuser
- Thin powered cables provide an ultra-clean look
- LED modules concealed within for even illumination
- Can be mounted on sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-33718	18"	22W	1495	940	WT White BK Black AL Brushed Aluminum  NEW NEW
PD-33732	32"	88W	6340	4435	
PD-33743	43"	128W	11115	7300	

Example: **PD-33732-BK**

Corso

PD-33743-AL shown

Cleverly hidden LED modules and a circular frosted diffuser floating inside a halo of spun aluminum work together for a beautiful, even illumination. Note the two new finishes—white and black—along with the original aluminum.

Tic Toc

6" LED Pendant

 **TITLE 24**
CALIFORNIA




PD-37806-AL shown


An elegant design with rounded diffusers features up and down illumination for ambient and task lighting, while a beautifully finished metal shade along with an ultra-thin power wire create the sleekest profile possible.

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 50,000 hours
Input: 120V

- Aluminum hardware, PC diffusers
- Thin powered aircraft cable provides an ultra-clean look
- Up and down illumination
- Can be mounted on a sloped ceiling
- Driver concealed within canopy

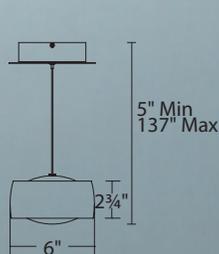

PD-37806

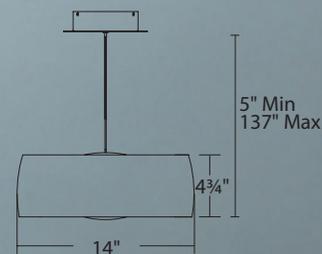

PD-37814

Tic Toc
14" LED Pendant



PD-37814-AL shown

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-37806	6"	15W	1198	685	AL <i>Brushed Aluminum</i> 
PD-37814	14"	28W	3150	1800	

Example: **PD-37806-AL**

Vida


18" and 24" LED Pendant

Now available in white and black



Color Temp: 3000K
CRI: 80
Dimming: 100% - 5% ELV & 0-10V
Rated Life: 83,000 hours
Input: 120-277V

- Thin powered aircraft cables provide an ultra-clean look
- LED modules positioned on tapered platform for more effective illumination
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

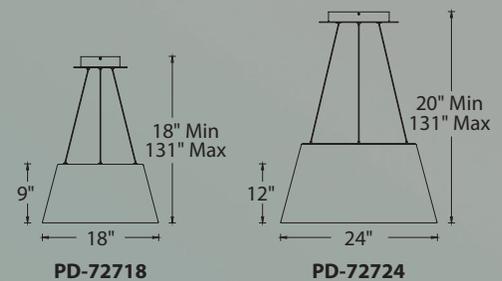

	Size	Watt	LED Lumens	Delivered Lumens	Finish	
PD-72718	18"	33W	2450	1755	WT White	
PD-72724	24"	43W	3235	2385	BK Black	
					AL Brushed Aluminum	

Example: **PD-72718-BK**

Vida

PD-72724-AL shown

A refreshing take on a traditional shape, the Vida pendant is crafted from high-quality spun aluminum, now finished in elegant black or white in addition to brushed aluminum. Inside, a powerful integrated LED array projects flawless light time and again.


Trap

20", 27" and 38" LED Pendant



PD-95820-BK shown


TITLE 24
DAMP CALIFORNIA

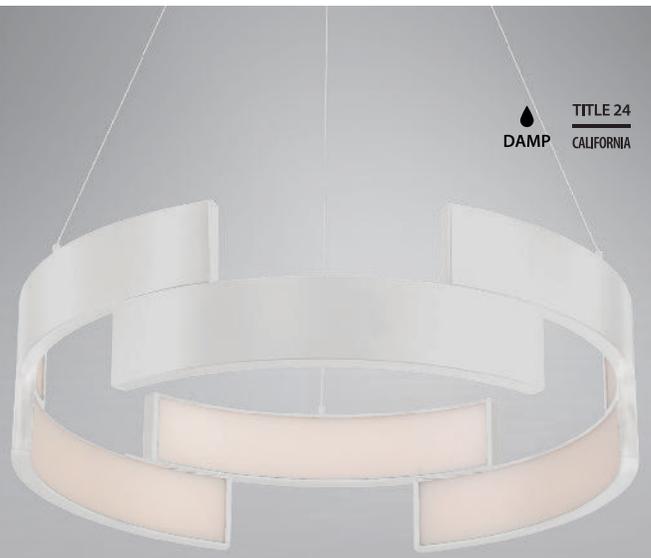


PD-95827-WT shown




PD-95838-CH shown

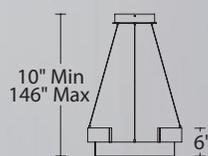

PD-95820

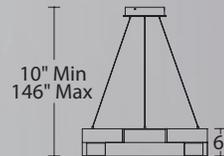

PD-95827

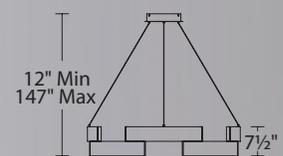

PD-95838

Trap



Futuristic design meets top-tier technology in this artful pendant, where cutting-edge LED light radiates inside terraced bands finished in black, chrome or white.

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 50,000 hours*
Input: 120–277V

- Thin powered aircraft cables match overall finish
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) within canopy**


	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-95820	20"	35W	2488	1914	CH Chrome BK Matte Black WT Matte White 
PD-95827	27"	65W	4647	3575	
PD-95838	38"	79W	5927	4559	

Example: **PD-95820-BK**

Interlace

28" and 39" LED Pendant


 **TITLE 24**
DAMP CALIFORNIA

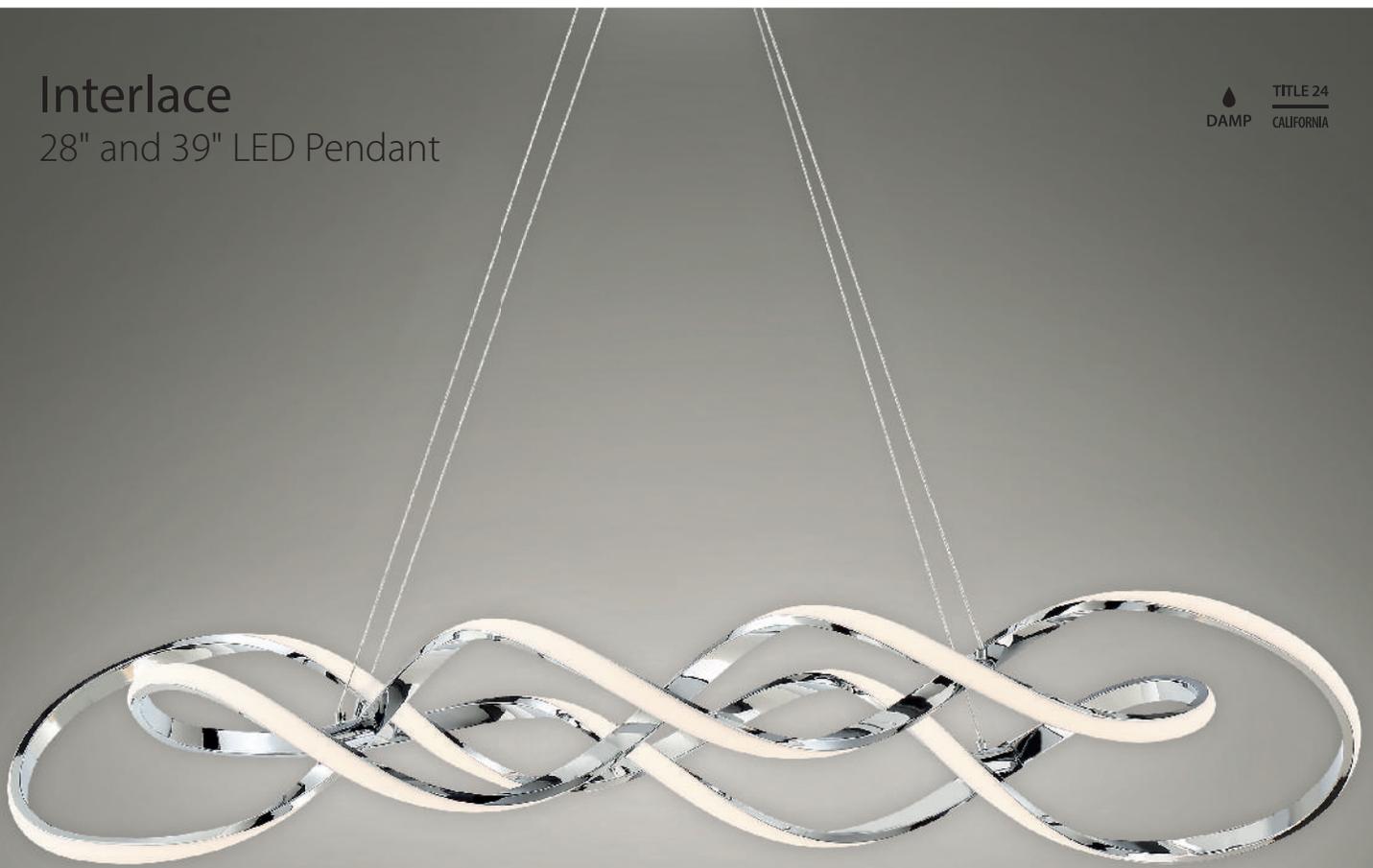

PD-47839-CH shown

Color Temp: 3000K
CRI: 90
Dimming: 100% - 10% ELV & 0-10V
Rated Life: 50,000 hours
Input: 120-277V

- Two seamless interlocked loops
- Thin powered cables provide an ultra-clean look
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

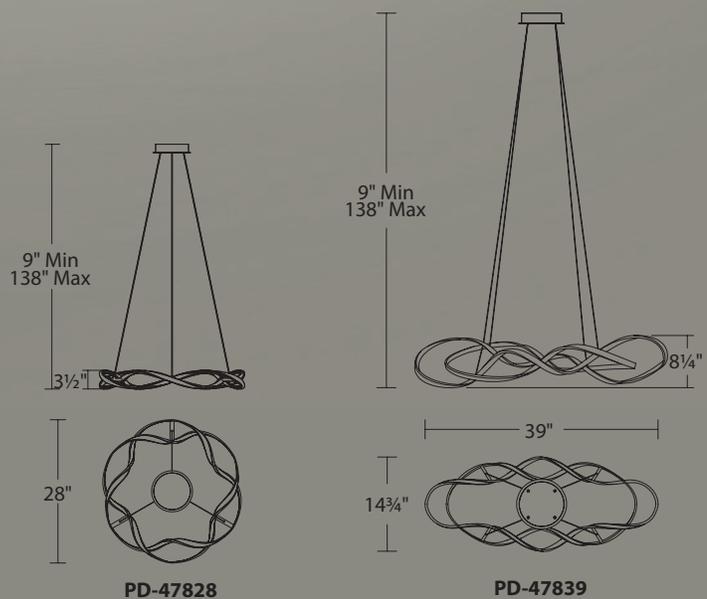

Interlace



Delicate bands of light weave playfully in and out on this flowing modern design. A continuous construction, a flexible diffuser, and powered aircraft cable suspension complete an overall clean, seamless look.


	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-47828	28"	57W	6551	4587	CH Chrome 
PD-47839	39"	57W	4734	3241	

Example: **PD-47828-CH**

Radius


2-light & 3-light LED Chandeliers

TITLE 24
DAMP CALIFORNIA

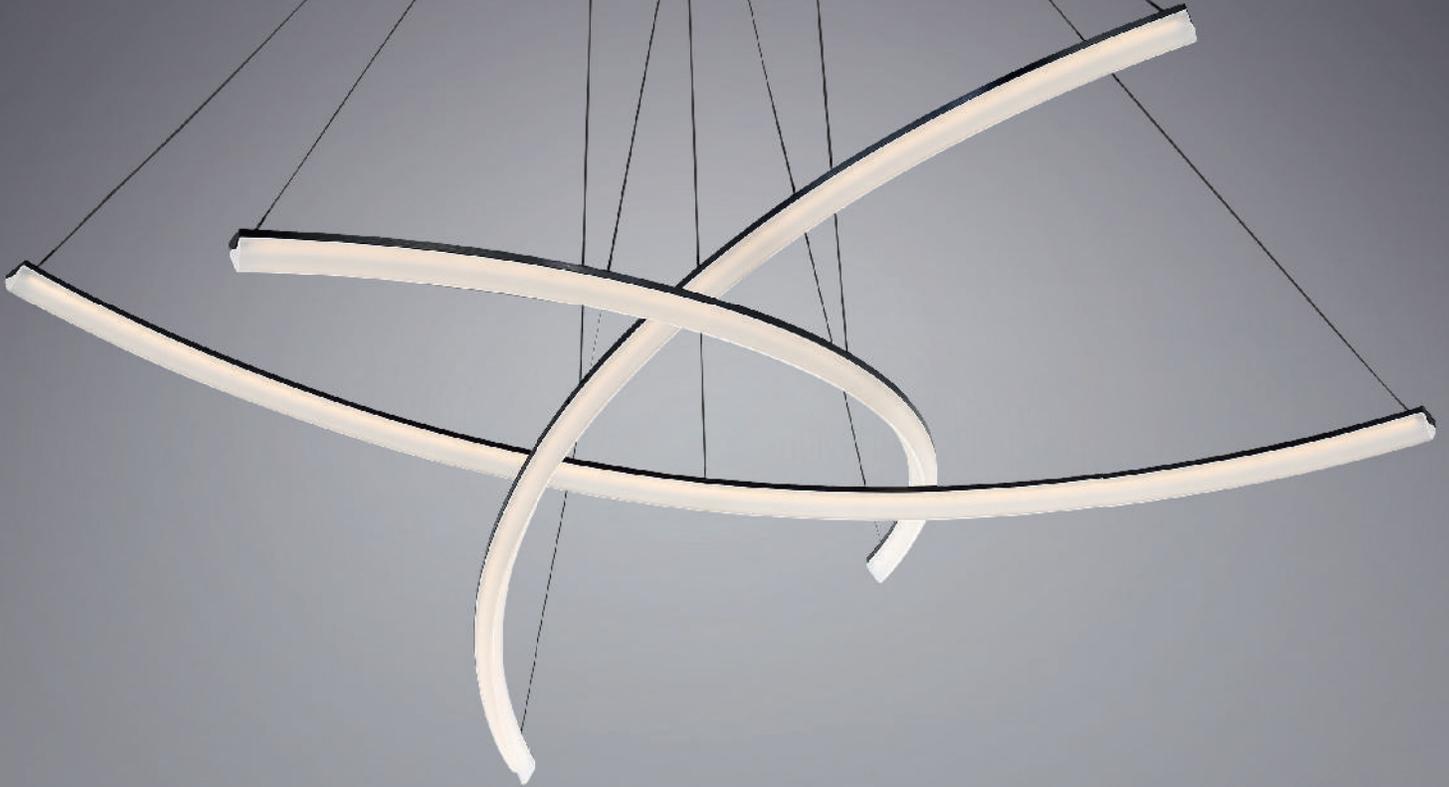

Color Temp: 3000K
CRI: 90
Dimming: 100%-10% ELV;
 0-10V
Rated Life: 50,000 hours
Input: 120-277V

- Thin color matched powered aircraft cables and hardware
- Multiple hanging options allow for personalization
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

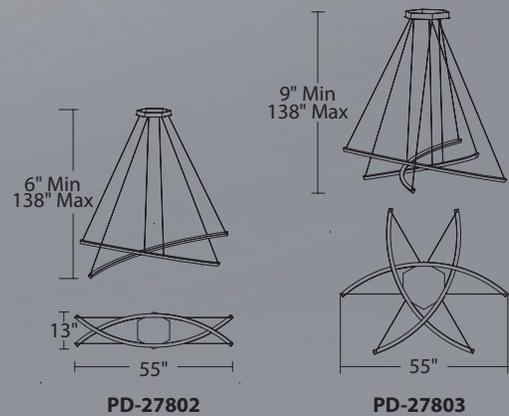

	Stems	Watt	LED Lumens	Delivered Lumens	Finish
PD-27802	2	58W	2600	1872	BK <i>Brushed Black</i>
PD-27803	3	86W	3900	2808	AL <i>Brushed Aluminum</i>


Example: **PD-27803-BK**

Radius

Long graceful stems of aluminum and light create a beautiful display that is both functional and modern art. With versatile hanging options, Radius lets you put a personal touch on any room. Choose two or three stems in brushed aluminum or brushed black.

Stack


3-light, 6-light & 9-light LED Chandeliers

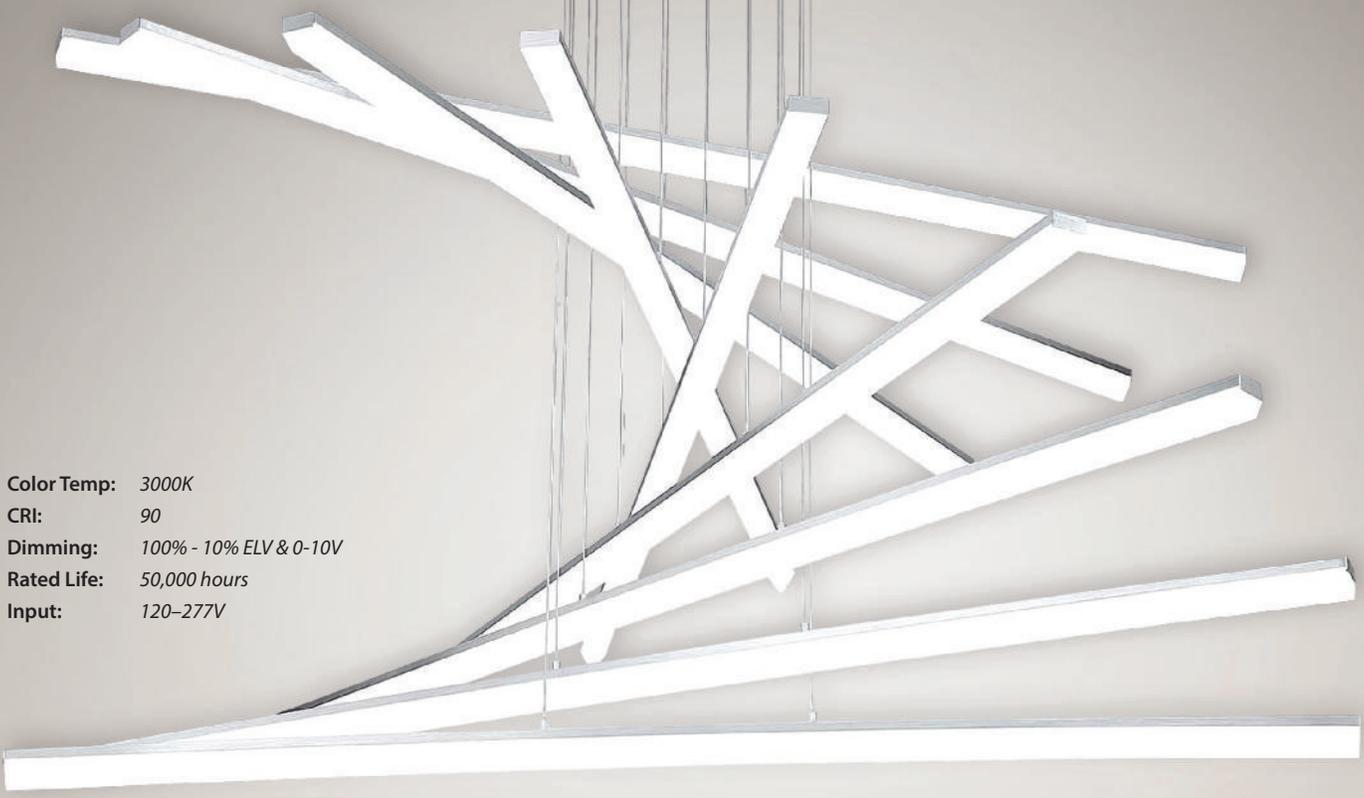

Color Temp: 3000K
CRI: 90
Dimming: 100% - 10% ELV & 0-10V
Rated Life: 50,000 hours
Input: 120-277V

A chandelier that is designed to your tastes—simply adjust the hanging height and slope of any stem exactly how you want to express your artistry. Thin powered suspension wires ensure a clean look no matter how you hang it.

- Aluminum hardware and extruded acrylic diffuser
- Thin color matched powered aircraft cables and hardware
- Height and slope of each strip can be individually adjusted for personalization
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

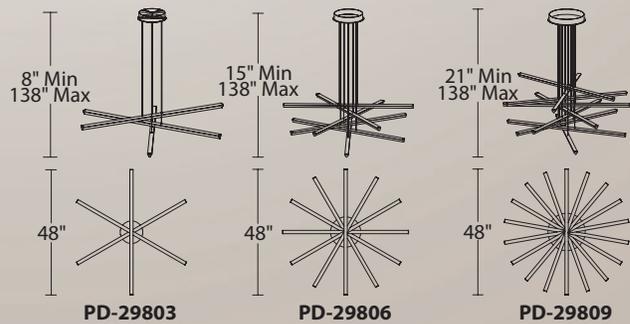

	Stems	Watt	LED Lumens	Delivered Lumens	Finish
PD-29803	3	42W	2570	1850	AL Brushed Aluminum BK Brushed Black
PD-29806	6	84W	5140	3701	
PD-29809	9	126W	7700	5544	

Example: **PD-29809-AL**

Stack



Frame


28" and 58" LED Pendant

 **TITLE 24**
CALIFORNIA



An extruded acrylic diffuser with mitered edges gives this design a clean, elevated look, evenly spreading the powerful LED light for a geometric illumination that matches back to the rectilinear canopy.

Color Temp: 3000K
CRI: 90
Dimming: 100% - 10% ELV & 0-10V
Rated Life: 50,000 hours
Input: 120-277V

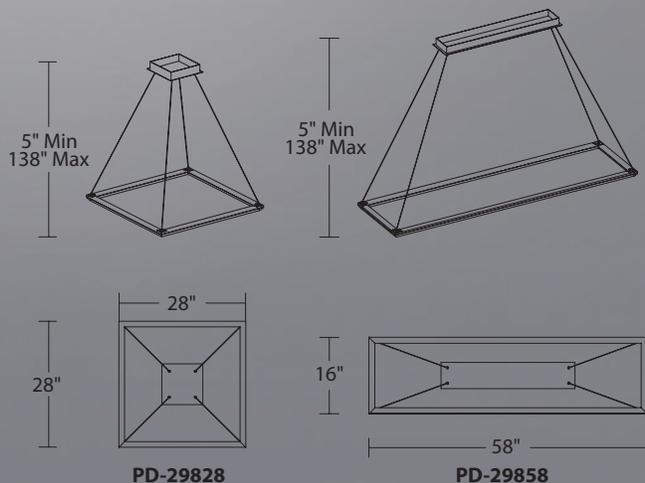

- Aluminum hardware and extruded acrylic diffuser
- Crisp mitered joints
- Thin color matched powered aircraft cables and hardware
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

Frame




	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-29828	28"	58W	2609	1878	BK <i>Brushed Black</i>
PD-29858	58"	58W	2857	2057	AL <i>Brushed Aluminum</i>



Example: **PD-29828-BK**

Line

48" Linear LED Pendant
Now available in brushed black

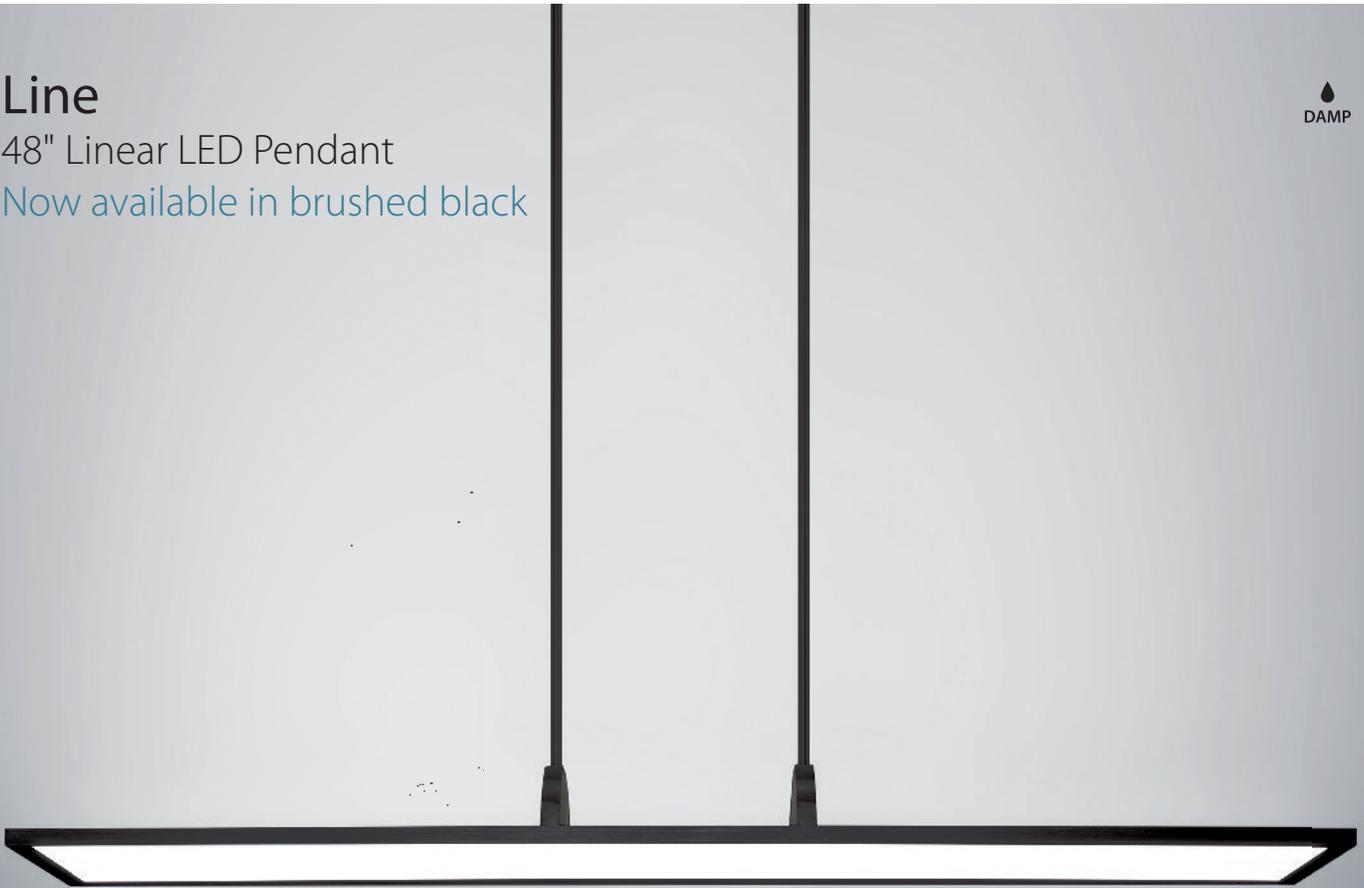


Edge-lit magic.

The profile of this direct and indirect pendant is just a single line under an inch thick.

Color Temp: 2700K, 3000K
CRI: 90
Dimming: 100% - 10% ELV
Rated Life: 60,000 hours
Input: 120V (277V special order)

- Super thin, edge-lit LED panels illuminate up and down
- Integral swivel for sloped ceilings
- 10' of wire included to extend pendant up to a total of 120" with additional downrod sold separately
- Six 12" and two 6" downrods included
- Transformer located in standard 4" junction box

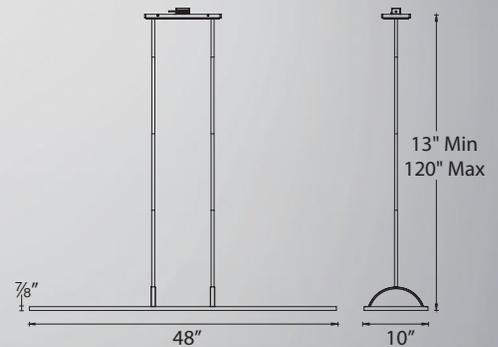

	Color Temp	Watt	LED Lumens	Delivered Lumens	Finish
PD-51148-27	2700K	48W	4017	2770	AL Brushed Aluminum 
PD-51148-30	3000K	48W	4435	3055	AL Brushed Aluminum  BK Brushed Black  NEW

Example: **PD-51148-27-BK**

For 277V, add an "F" before the color temperature: **PD-51148F-27-BK**

Loophole

52" LED Pendant


 **TITLE 24**
DAMP **CALIFORNIA**



Clever design details like weighted fasteners that keep the pendant level and coated suspension wires that deliver power take this luminaire to the next level, while the elegant center loop projects in 360-degrees for ambient and task light.

Color Temp: 3000K
CRI: 90
Dimming: 100%–5% ELV
Rated Life: 50,000 hours*
Input: 120–277V

- Flexible composite diffuser
- Thin powered cables provide an ultra-clean look
- Suspension height can be adjusted easily with quick release
- Fasteners maintain tension to hold fixture level
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

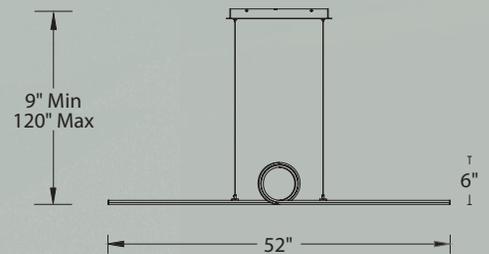

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-23852	52"	43.9W	4261	2733	AL <i>Brushed Aluminum</i> BK <i>Black</i>

Example: **PD-23852-BK**

Vornado

29" LED Pendant



 TITLE 24
 CALIFORNIA




PD-87729-CH shown

Color Temp: 3000K
CRI: 90
Dimming: 100% - 10% ELV & 0-10V
Rated Life: 50,000 hours
Input: 120-277V

- Hand-crafted, seamless construction
- Thin powered cables provide an ultra-clean look
- Can be mounted on a sloped ceiling
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

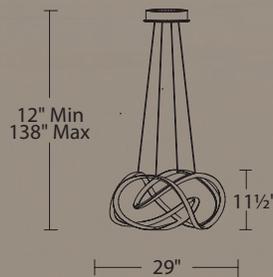

PD-87729

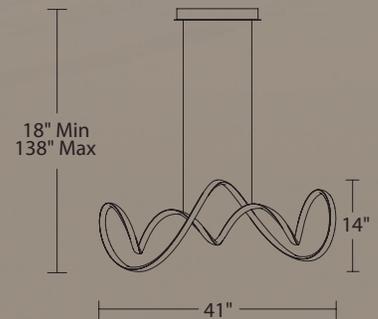

PD-87741

Vornado

41" LED Pendant



PD-87741-CH shown

With its captivating and continuous loops, Vornado pushes the limits of engineering—bands of silver and light twist in and out like a Mobius strip on steroids. Finely wrought in spun aluminum and plated with chrome for extra shine.

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-87729	29"	85W	7766	5375	CH Chrome 
PD-87741	41"	85W	7818	5861	

Example: **PD-87729-CH**

Vornado

20", 23" and 35" Linear LED Pendant

Now available in white



Color Temp: 3000K
CRI: 80
Dimming: 100%–5% ELV, 0-10V (20")
 100%–10% ELV, 0-10V (23" & 35")
Rated Life: 60,000 hours
Input: 120–277V


- Aluminum hardware, extruded composite diffuser
- Hand-crafted, seamless construction
- Thin powered cables provide an ultra-clean look
- Can be mounted on a sloped ceiling
- PD-87720 is Title 24 compliant
- **Universal voltage driver (120V-220V-277V) concealed within canopy**



PD-87720-WT shown



PD-87735-WT shown

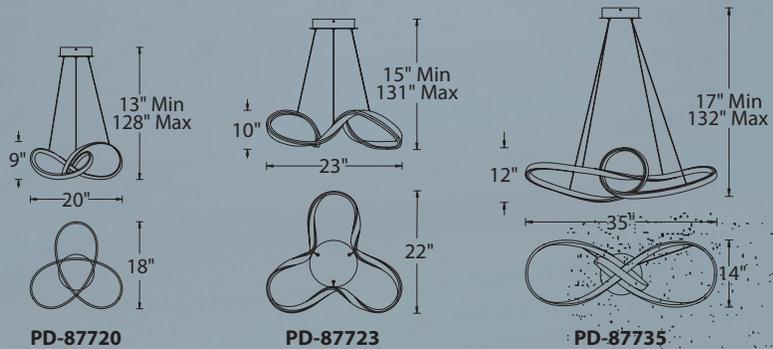

Vornado



PD-87723-CH shown

	Size	Watt	Delivered Lumens	Finish
PD-87720	20"	30.5W	2075	
PD-87723	23"	52W	3110	WT White
PD-87735	35"	52W	3550	CH Chrome

WT White

CH Chrome



NEW

Example: **PD-87723-CH**

Vornado



With its captivating and continuous loops, Vornado pushes the limits of engineering—bands of silver and light twist in and out like a Mobius strip on steroids. Finely wrought in extruded aluminum and plated with chrome for extra shine.

Vornado


31" LED Ceiling Mount

 **TITLE 24**
DAMP CALIFORNIA



Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV & 0–10V
Rated Life: 50,000 hours
Input: 120–277V

- Hand-crafted, seamless construction
- **Universal voltage driver (120V-220V-277V) concealed within canopy**

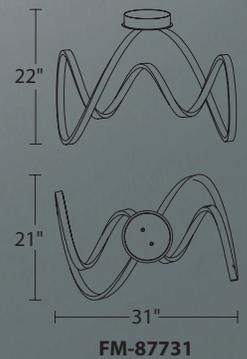


	Size	Watt	LED Lumens	Delivered Lumens	Finish
FM-87731	31"	85W	7059	5375	CH Chrome 

Example: **FM-87731-CH**

Geos

6" and 10" LED Ceiling and Wall

 Now available in brushed brass



Updated in a stylish brass finish to complement the latest interior trends, this super-slim design floats less than an inch from the wall or ceiling and provides ample light without any shadows or hot spots. Available in brushed brass, titanium and powder white.

Color Temp: 2700K, 3000K
CRI: 90
Dimming: 100%–10% ELV; 0-10V
Rated Life: 70,000 hours
Input: 120V (277V special order)

- Aluminum hardware, frosted acrylic diffuser
- Edge-lit LED with light-extraction panel for even illumination
- Easy installation with twist-lock mechanism (no visible hardware)
- 2" x 1.38" x 1.02" transformer installs within junction box
- ADA compliant



		Size	Color Temp	Watt	LED Lumens	Delivered Lumens	Finish
	FM-4606-27	6"	2700K	8W	551	270	BR Brushed Brass  NEW TT Titanium  WT White 
	FM-4606-30		3000K	8W	608	300	
	FM-4610-27	10"	2700K	12W	964	545	
	FM-4610-30		3000K	12W	1064	600	

Example: **FM-4606-30-BR**

For 277V special order, add an "F" before the color temperature: **FM-4610F-27-BR**


Geos

15", 22" LED Ceiling and Wall
Now available in brushed brass



Color Temp: 2700K, 3000K
CRI: 90
Dimming: 100% - 10% ELV
Rated Life: 50,000 hours*
Input: 120-277V

- Aluminum hardware, frosted acrylic diffuser
- Edge-lit LED with light-extraction panel for even illumination
- Easy installation with twist-lock mechanism (no visible hardware)
- **2.76" x 1.26" x 1.18" universal voltage driver (120V-220V-277V) installs within junction box**
- ADA compliant

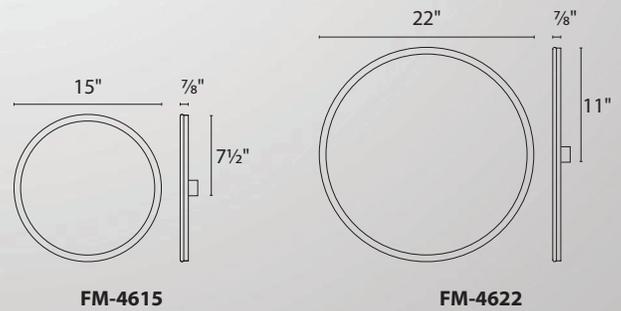

		Size	Color Temp	Watt	LED Lumens	Delivered Lumens	Finish
	FM-4615-27	15"	2700K	29W	2330	1485	BR Brushed Brass TT Titanium WT White
	FM-4615-30		3000K	29W	2355	1660	
	FM-4622-27	22"	2700K	44W	3745	2235	
	FM-4622-30		3000K	44W	3785	2375	



Example: **FM-4622-30-BR**
For 277V special order, add an "F" before the color temperature: **FM-4615F-27-BR**

Dot


6", 9", 12" and 15" Interior/Exterior LED Ceiling & Wall



Dot's finely crafted diffuser amplifies the brightness on this durable waterproof outdoor flush mount while also showing off its impressive heft and depth. Rendered in highly durable marine-grade stainless steel, Dot withstands the toughest conditions but can also complement interior metal finishes just as well.

Color Temp: 3000K, 3500K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 54,000 hours
Input: 120V (277V special order)

- Weather-resistant 316 stainless steel body
- Lightweight, injection-molded, UV-rated acrylic diffuser enhances brightness, safety lock prevents slippage
- No transformer or driver needed
- 277V option available for 9", 12" & 15" sizes (special order)
- ADA compliant

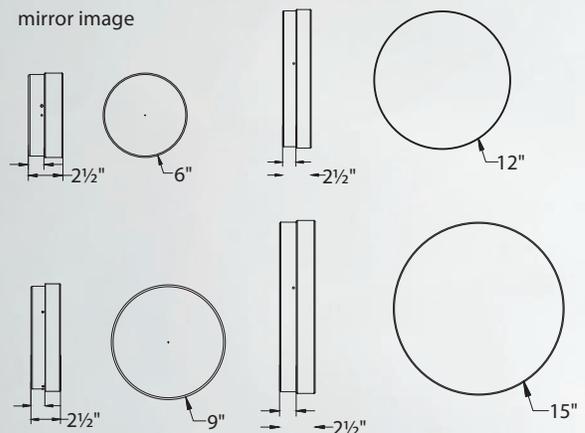

Dot



	Size	Watt	LED Lumens	Delivered Lumens	Finish
FM-W57806-30	6"	9W	600	432	SS <i>Stainless Steel</i> 
FM-W57806-35		9W	651	469	
FM-W57809-30	9"	17W	1542	997	
FM-W57809-35		17W	1674	1082	
FM-W57812-30	12"	26W	2315	1380	
FM-W57812-35		26W	2513	1499	
FM-W57815-30	15"	27W	2729	1495	
FM-W57815-35		27W	2963	1623	

Example: **FM-W57809-30-SS**

For 277V special order, add an "F" before the color temperature: **FM-W57812F-30-SS**

Copa


9", 13" and 17" Interior/Exterior LED Pendants



The smooth graceful lines of the matte-finished shade contrast with the textured gold interior on this elegant pendant, perfect for dining rooms, kitchens, alcoves, restaurants and hospitality spaces.

Color Temp: 3000K
CRI: 90
Dimming: 100% - 10% ELV, 0-10V
Rated Life: 50,000 hours*
Input: 120V

- Aluminum construction
- Smooth round exterior with weather-resistant finish, contrast ribbing on interior
- Three 12" and one 6" downrod included, additional rods available
- Can be mounted on a sloped ceiling, swivel attachment included for seismic protection
- Driver concealed within canopy
- IP65 rated

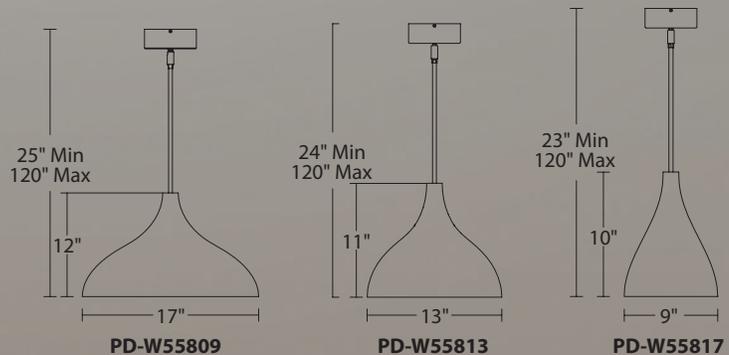

Copa



	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-W55809	9"	15W	833	386	
PD-W55813	13"	18W	1233	633	WT/GR White/Gold Ribbed BK/GR Black/Gold Ribbed
PD-W55817	17"	18W	1330	619	

Example: **PD-W55813-BK/GR**


Grate

12", 18" and 28" LED Interior/Exterior Wall



Color Temp: 3000K
 CRI: 90
 Dimming: 100% - 10% ELV
 Rated Life: 50,000 hours*
 Input: 120V

- Aluminum construction
- Weather-resistant finish
- No transformer or driver needed
- ADA compliant
- IP65 rated

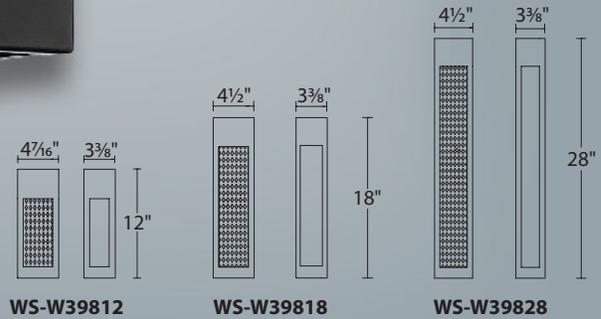

		Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W39812	12"	8W	602	132	BK <i>Black</i>
	WS-W39818	18"	10W	811	190	
	WS-W39828	28"	13W	980	214	

 
Example: **WS-W39818-BK**



A heavy-gauge perforated screen softens the effect of the light on this outdoor sconce, crafted in durable aluminum and finished in weather-resistant black for an effortless look.


Block

6" and 8" LED Interior/Exterior Wall



Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV
 Rated Life: 50,000 hours
 Input: 120V–277V

- Aluminum construction, die-cast glass accents
- Weather-resistant finish
- 6" version can be mounted in either direction
- **Universal voltage driver (120V-220V-277V) concealed within fixture**
- ADA compliant
- IP65 rated

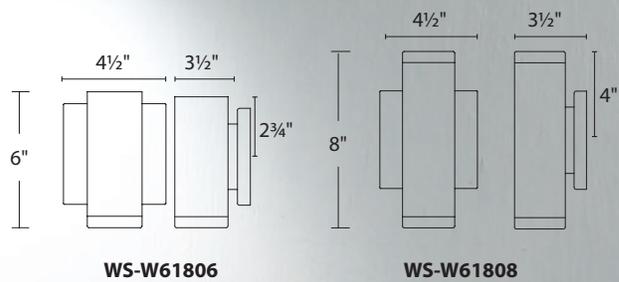

		Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W61806	6"	9W	615	540	AL <i>Brushed Aluminum</i> BK <i>Black</i> 
	WS-W61808	8"	15W	947	773	

Example: **WS-W61808-AL**

Block




WS-W61806-BK shown

Sometimes the simplest forms are the most sophisticated, like this clean, effortless block design featuring eye-catching die-cast glass accents and weather-resistant finishes in aluminum and black.


Inset

12" and 16" LED Interior/Exterior Wall

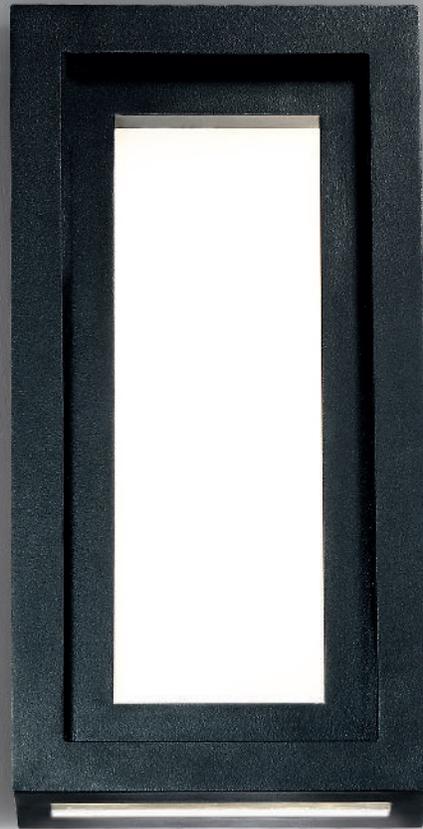

Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV
 Rated Life: 50,000 hours*
 Input: 120V–277V

- Customizable - contact factory for options
- Aluminum construction
- UV-rated double-layer acrylic/PC diffuser, additional etched glass diffuser at bottom for downlight
- **Universal voltage driver (120V-220V-277V) concealed within fixture**
- ADA compliant

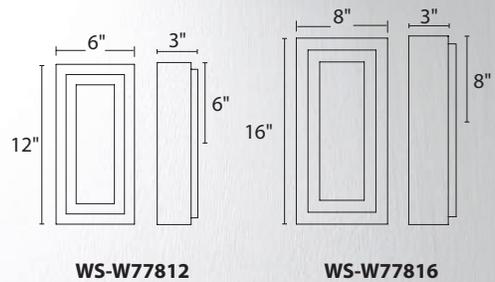


WS-W77812

WS-W77816

		Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W77812	12"	20W	1061	743	BK Black 
	WS-W77816	16"	27W	1400	980	

Example: **WS-W77812-BK**

Inset

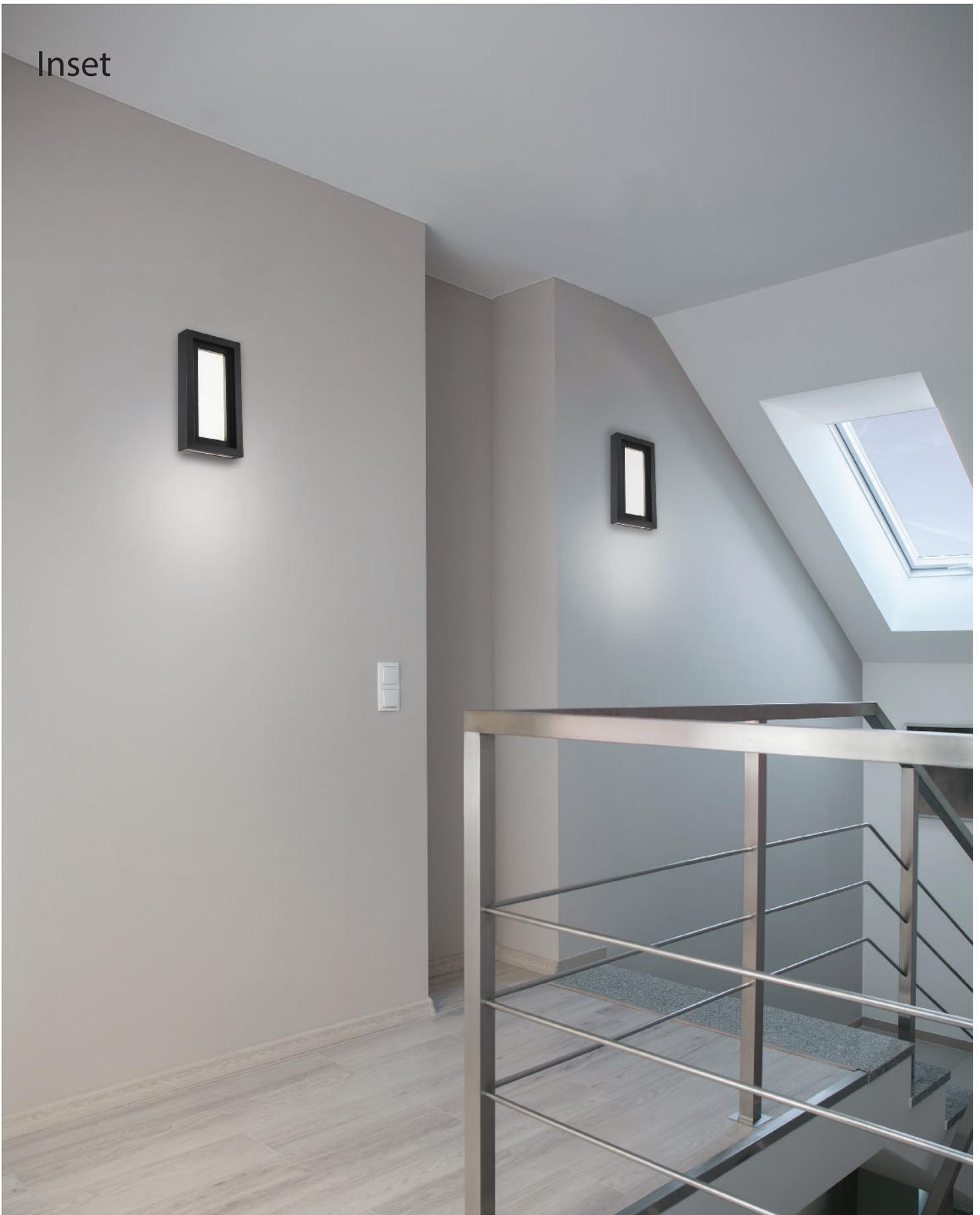

Edge-mounted LED modules stream powerful light into an innovative extraction panel, which then projects outward through the diffuser for a beautiful illumination framed in a black-finished aluminum shadow box.

Case

9", 14" and 20" LED Outdoor




TITLE 24
CALIFORNIA



Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 54,000 hours
Input: 120V (277V Special Order)

- Aluminum or 316 stainless steel construction, UV-rated acrylic diffuser
- Weather-resistant finish for aluminum
- No transformer or driver needed
- ADA compliant
- IP65 rated

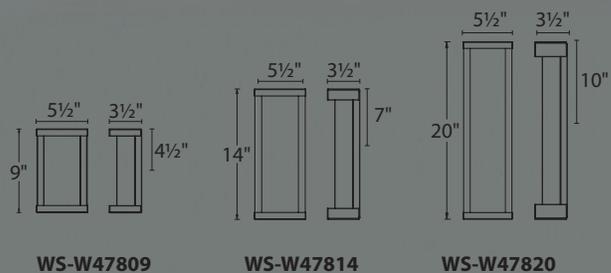

Case



This outdoor sconce adapts to almost any environment with a clean, simple form finished in weather-resistant black or durable stainless steel. Inside, a cutting-edge array of LEDs broadcasts beautiful, energy-efficient light through a mitered acrylic diffuser. Mount it vertically or horizontally.

		Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W47809	9"	13W	1040	405	SS <i>Stainless Steel</i> BK <i>Black</i> 
	WS-W47814	14"	22W	1644	843	
	WS-W47820	20"	34W	2560	1034	

Example: **WS-W47809-SS**

For 277V special order, add an "F" before the finish: **WS-W47814F-BK**


Cylo

9", 16" and 24" LED Outdoor




Color Temp: 3000K, 4000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 54,000 hours
Input: 120V (277V Special Order)


- Aluminum construction, natural white UV-rated acrylic diffuser
- Weather-resistant finish
- No transformer or driver needed
- IP65 rated

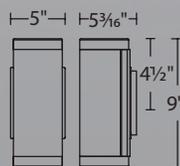

WS-W91809

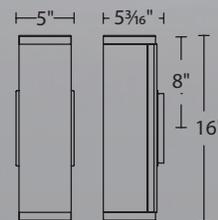


WS-W91816

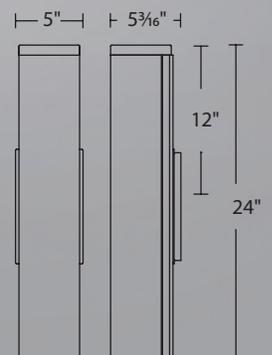


WS-W91824

Cylo

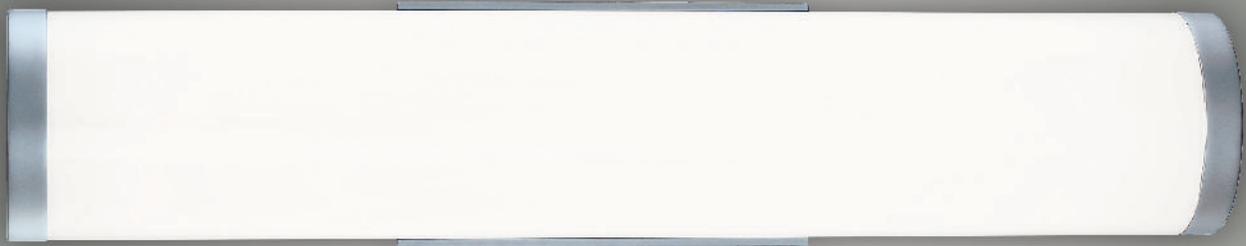

 Crafted in aluminum with contrast end-caps in durable weather-resistant finishes, Cylo provides reliable illumination in a simple form that's perfect for outdoor paths and entryways.

		Size	Watt	Color Temp	LED Lumens	Delivered Lumens	Finish
	WS-W91809-30	9"	10W	3000K	776	399	BZ Bronze TT Titanium 
	WS-W91809-40		10W	4000K	889	457	
	WS-W91816-30	16"	20W	3000K	1683	1065	
	WS-W91816-40		20W	4000K	1719	1087	
	WS-W91824-30	24"	37W	3000K	3132	2040	
	WS-W91824-40		37W	4000K	3256	2121	

Example: **WS-W91824-40-TT**

For 277V special order, add an "F" before the color temperature: **WS-W91824F-40-BZ**

Steampunk


9" and 13" LED Interior/Exterior Wall

Now available in black



Color Temp: 3000K
 CRI: 90
 Dimming: 100%–10% ELV
 Rated Life: 80,000 hours
 Input: 120V (277V special order)

- Aluminum construction
- Mouth blown glass is seeded and hammered to create dramatic patterns
- Weather resistant finish
- No transformer or driver required
- IP65 rated

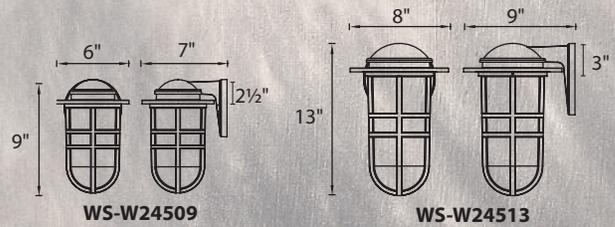

	Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W24509	9"	10W	624	365
	WS-W24513	13"	10W	657	440

BK Black

BZ Bronze

GH Graphite



NEW

Example: **WS-W24513-BK**

For 277V special order, add an "F" before the finish: **WS-W24513F-BK**

Steampunk



Inside a vintage-inspired die-cast aluminum base, the glass—clear, hammered, seeded, and mouth blown for an outstanding artisanal look—projects beautiful light from a powerful LED array. Updated with a black finish, along with the original bronze and graphite.


Chamber

12", 16" and 20" LED Outdoor


Now available in black




Updated with a fresh black finish, this family of outdoor sconces, pendants and post lights offers a bold, Mid-Century modern look with intersecting aluminum frames and cutting-edge LED light.

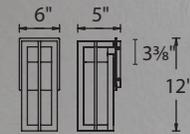

WS-W48612

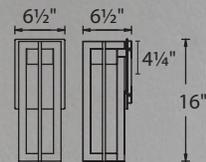

WS-W48616

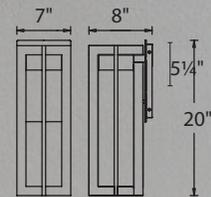

WS-W48620

Color Temp: 3000K
CRI: 90
Dimming: 100%–10% ELV
Rated Life: 50,000 hours*
Input: 120V (277V special order)

- Solid aluminum construction with weather-resistant finish
- Minimal mounting hardware for easy installation
- Light engine is factory sealed for maximum protection from the elements
- No transformer or driver required
- IP65 rated


		Size	Watt	LED Lumens	Delivered Lumens	Finish
	WS-W48612	12"	10W	800	195	BK Black BZ Bronze NEW
	WS-W48616	16"	12W	1000	250	
	WS-W48620	20"	18W	1600	595	

Example: **WS-W48616-BK**

For 277V, add an "F" before the finish: **WS-W48616F-BK**

Chamber

16" LED Outdoor
Pendant
Now available
in black

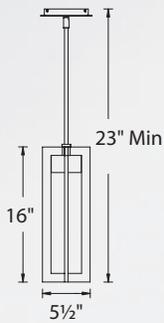


	Size	Watt	LED Lumens	Delivered Lumens	Finish
PD-W48616	16"	12W	1000	295	BK Black NEW BZ Bronze

Example: **PD-W48616-BK**



20" LED Outdoor Post Lantern
Now available in black

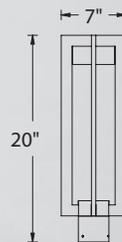

	Size	Watt	LED Lumens	Delivered Lumens	Finish
PM-W48620	20"	17.5W	1600	660	BK Black NEW BZ Bronze

Example: **PM-W48620-BZ**

Alphabetical Index

B

BLISS	20
BLOCK.....	68
BOSSA NOVA	28, 30, 32
BRINK	16

C

CASE.....	72
CHAMBER	78
COPA.....	64
CORSO.....	36
CYLO	74

D

DOT	62
-----------	----

E

ELEMENTUM	24
ENDURE.....	6
ESPRIT	22

F

FRAME.....	50
------------	----

G

GEOS	60
GRATE.....	66

I

INSET.....	70
INTERLACE.....	44

L

LEVEL	10
LINE	12, 52
LOOPHOLE	53

N

NIGHTSTICK	14
------------------	----

O

OMEGA	34
-------------	----

R

RADIUS	46
RATIO.....	18

S

STACK	48
STEAMPUNK	76
STRETCH	26

T

TIC TOC	38
TRAP.....	42
TRIO.....	4

V

VERGE.....	11
VIDA.....	40
VORNADO.....	54, 56, 58

W

WAND.....	2
WEDGE.....	8



dweLED

by WAC Lighting

2018 Introduction

wacighting.com