

TOOLS, DRILLS AND ACCESSORIES



INSULATED (1000V) SCREWDRIVER SET

4 PIECE

- **Patented Dual Layer** design provides greater protection against electric shock.
- **Dual Material** PP & TPV cushion grip provides slip resistance to chemical, oil and most solvents.

PART#	UPC#	SIZES	HEAD STYLE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
ISK4	16281	1/4" x 6"	Slotted	1.15	1	43.13/ea
		5/16" x 7"	Slotted			
		No. 1 x 3 3/16"	Phillips			
		No. 2 x 4"	Phillips			



1/4 DRIVE STANDARD/METRIC SOCKET MASTER SET

48 PIECE

PART#	UPC#	SIZES	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MSOC14	16274	STANDARD	2.69	1	113.75/ea
		1/4 Drive SAE 6 Point Standard Socket 5/32			
		1/4 Drive SAE 6 Point Standard Socket 3/16			
		1/4 Drive SAE 6 Point Standard Socket 7/32			
		1/4 Drive SAE 6 Point Standard Socket 1/4			
		1/4 Drive SAE 6 Point Standard Socket 9/32			
		1/4 Drive SAE 6 Point Standard Socket 5/16			
		1/4 Drive SAE 6 Point Standard Socket 11/32			
		1/4 Drive SAE 6 Point Standard Socket 3/8			
		1/4 Drive SAE 6 Point Standard Socket 7/16			
		1/4 Drive SAE 6 Point Standard Socket 1/2			
		1/4 Drive SAE 6 Point Standard Socket 9/16			
		METRIC			
		1/4 Drive Metric 6 Point Standard Socket 4mm			
		1/4 Drive Metric 6 Point Standard Socket 4.5mm			
		1/4 Drive Metric 6 Point Standard Socket 5mm			
		1/4 Drive Metric 6 Point Standard Socket 5.5mm			
		1/4 Drive Metric 6 Point Standard Socket 6mm			
		1/4 Drive Metric 6 Point Standard Socket 7mm			
		1/4 Drive Metric 6 Point Standard Socket 8mm			
		1/4 Drive Metric 6 Point Standard Socket 9mm			
		1/4 Drive Metric 6 Point Standard Socket 10mm			
		1/4 Drive Metric 6 Point Standard Socket 11mm			
		1/4 Drive Metric 6 Point Standard Socket 12mm			
		1/4 Drive Metric 6 Point Standard Socket 13mm			
		1/4 Drive Pear Ratchet Handle 72 Teeth 4.5			
		1/4 Drive Extension Bar 2			
		1/4 Drive Extension Bar 6			
		1/4 Drive Universal Joint			
		Bits Set 1: T10, T15, T20, T25, T27, T30, T40, PH1, PH2, PH3			
		Bits Set 2: 3/16, 7/32, 1/4, S1, S2, H3, H4, H5, H6 Hex Adapter			
		Ratcheting Screwdriver			

TOOLS, DRILLS AND ACCESSORIES



32 PC. SCREWDRIVER BIT SET



Slim and Compact Design Convenient Clip

- Industrial quality
- RC. Hardness 58-62
- Snap locking case
- Great for the job, home or garage

PART#	UPC#	SIZES/ITEMS	WT.PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MTECH32	19819	Phillips: #0, #1, #2 (2), #3, #2DW (2)	.70	1	41.88/ea
		Slotted: 6-8, 8-10, 10-12			
		Square: #0, #1, #2 (3), #3			
		Hex: $\frac{5}{64}$, $\frac{3}{32}$, $\frac{7}{64}$, $\frac{1}{8}$, $\frac{5}{32}$, $\frac{3}{16}$			
		Star: T8, T10, T15, T20, T25, T27, T30, T40			
		¼ Impact Driver Adaptor			
		¼ Auto Locking Magnetic Bit Holder			



32 PC. TAMPER PROOF BIT SET



Slim and Compact Design Convenient Clip

- Industrial quality
- RC. Hardness 58-62
- Snap locking case
- Great for the job, home or garage

PART#	UPC#	SIZES/ITEMS	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MTECH32TR	19818	Spanner: #6, #8, #10, #12, #14	.70	1	44.88/ea
		Star Tamper: T8, T9, T10, T15, T20, T25, T27			
		Hex Tamper: $\frac{3}{32}$, $\frac{1}{8}$, $\frac{9}{64}$, $\frac{5}{32}$, $\frac{3}{16}$, $\frac{7}{32}$, $\frac{1}{4}$, $\frac{5}{16}$			
		Tri-Wing: #1, #2, #3			
		Square: #1, #2, #3			
		Phillips: #2, #3			
		¼ Impact Driver Adaptor			
		¼ Auto Locking Magnetic Bit Holder			

MSTD2061

Drill Diameter $\frac{3}{8}$ "
Useable Length $1\frac{1}{16}$ "
For ¼-20 Drop-In Anchor
JDIA14



STOP BITS

Don't guess how deep to drill! Let Metallics help!

MSTD2083

Drill Diameter $\frac{1}{2}$ "
Useable Length $1\frac{11}{16}$ "
For ¾-16 Drop-In Anchor
JDIA38



PART#	UPC#	DRILL DIAMETER	DROP-IN ANCHOR SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MSTD2061	24568	$\frac{3}{8}$	¼-20	.20	1	39.20/ea
MSTD2083	24569	$\frac{1}{2}$	¾-16	.20	1	44.80/ea



LEATHERMAN® SQUIRT® ES4 TOOL

The Best Wire Stripper

13 Tools!

- Spring-action Needlenose Pliers
- Spring-action Wire Strippers (12GA, 14GA, 16GA, 18GA and 20GA)
- Spring-action Electrical Wire Cutters
- 420HC Knife
- Scissors
- Medium Screwdriver
- Wood/Metal Files
- Bottle Opener

PART#	UPC#	DESCRIPTION	QTY/ PKG	SUGGESTED TRADE LIST PRICE PER
MLES4RED	12976	Leatherman SQUIRT 13 Tool & Wire Stripper with Sheath - Red	1	77.63/ea

TOOLS, DRILLS AND ACCESSORIES



14 IN 1 MULTI TOOL

Stainless Steel with Black Plastic Handle Grip

Tool Contains:

- Pliers
- Wire Cutters
- Can Opener
- Phillips – Small, Medium and Large Screwdriver
- Fish Scaler
- Hook Removal
- Ruler
- Knife
- Awl
- Saw and File
- Nylon Pouch with Belt Loop

PART#	UPC#	ACCESSORY	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MPWSNP	35075	Nylon Belt Pouch	.49	1	22.34/ea



LEATHERMAN® SURGE™ TOOL

21 Tools!

- Needlenose Pliers
 - Regular Pliers
 - Wire Cutters
 - Hard-wire cutters
 - Electrical Crimper
 - 420HC Knife
 - 420HC Serrated Knife
 - Saw
 - Scissors
 - Wood/Metal Files
 - Diamond-coated File
 - Blade Exchanger
 - Large Bit Driver
 - Small Bit Driver
 - Large Screwdriver
 - AWL with Thread Loop
 - Ruler (9 in / 22 cm)
 - Bottle Opener
 - Can opener
 - Wire Stripper
- 2 Piece Bit Kit**
- Phillips #1-2 and Screwdriver $\frac{3}{16}$ "
 - Phillips & Flat Eyeglass Screwdriver

PART#	UPC#	ACCESSORY	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MLSG21	12964	Sheath	.42	1	278.21/ea



LEATHERMAN® C33 KNIFE -TOOL


2 TOOLS!

Tool Specs:

- 420HC Blade
- Carabiner/ Bottle Opener
- Thumb Stud
- Removable Pocket Clip
- Glass Filled Nylon Handle
- Blade Length – 2.6 in / 6.6 cm
- Weight – 2.36 oz / 66.9 g

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MLCK1	12984	.20	1	37.25/ea

TOOLS, DRILLS AND ACCESSORIES

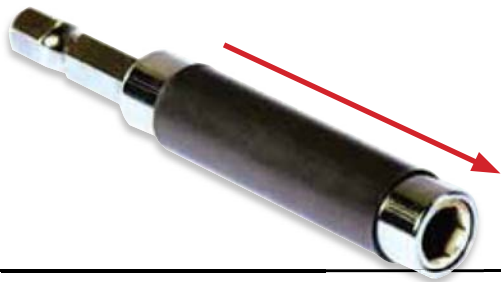

SCREW SLEEVE GUIDE HOLDER

STOP DROPPING YOUR SCREWS!

Sleeve extends up to 8" (on 5" length sleeve guide) and 6" (on 3" length sleeve guide) to hold screw while fastening.

PART#	UPC#	SLEEVE	SHANK	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SGH143	73954	3"	1/4	.07	1	11.18/ea
SGH145	73955	5"	1/4	.10	1	14.00/ea



RATCHETING ADJUSTABLE WRENCH

- **Combination Function** ratcheting and adjusting.
- **Anti-Slip Comfort Grip Design** TPR material handle with ridged design ensures a strong grip and prevents slippage.
- **Efficient** Ratcheting function offers greater efficiency compared to conventional wrenches.

PART#	UPC#	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RAW8	51409	8"	.80	1	38.75/ea



THE ULTIMATE SUPER STRENGTH POLYTARP

- Heavy duty double laminated coating
- Extra strength weave
- Sun and fade resistant
- Rot and rust proof
- No leaks, no tears
- Heat sealed seams
- Grommets every 3 ft.
- Rope reinforced hem

PART#	UPC#	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BPT1020	30058	10 x 20	2.11	1	17.50/ea
BPT1216	30057	12 x 16	1.91	1	18.13/ea
BPT1220	30056	12 x 20	2.43	1	21.25/ea
BPT1620	30055	16 x 20	3.52	1	28.25/ea
BPT2020	30054	20 x 20	4.92	1	35.63/ea
BPT2030	30053	20 x 30	6.39	1	53.13/ea
BPT2040	30052	20 x 40	8.35	1	70.75/ea
BPT3040	30051	30 x 40	8.96	1	106.25/ea
BPT4040	30050	40 x 40	21.42	1	141.75/ea

TOOLS, DRILLS AND ACCESSORIES



SAFETY VEST

General Purpose Vest
Fluorescent Lime Green and Fluorescent Orange

MSVGXXL:

- Fluorescent Lime Green Polyester Mesh.
- 1" Silver Retroreflective silver stripes, front and back.
- Velcro closure.
- One size fits all.

MSVOXXL:

- Fluorescent Orange Polyester Mesh.
- 1" wide PVC yellow stripes, front and back.
- Velcro closure.
- One size fits all.

PART#	UPC#	COLOR	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MSVGXXL	17670	Lime Green	.21	1	19.84/ea
MSVOXXL	17671	Fluorescent Orange	.20	1	19.84/ea



PYRAMEX 4 POINT HARDHATS

WITH PIN LOCKS OR RATCHET SUSPENSION

- Shell construction from high density polyethylene
- Low profile design
- Rain trough on sides and back of helmet to channel moisture away.
- Soft brow pad is replaceable and washable.
- Universal accessory slots fit cap mounted ear muffs and chin straps.
- Complies with ANSI Z89.1, 2003, Type 1 Class E & G Standards

PART#	UPC#	COLOR	SUSPENSION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MSFTW1	17645	White	Pin Lock	.89	1	28.32/ea
MSFTY1	17646	Yellow	Pin Lock	.89	1	28.32/ea
MSFTB1	17648	Blue	Pin Lock	.89	1	28.32/ea
MSFTW2	17655	White	Ratchet	.89	1	34.85/ea
MSFTY2	17656	Yellow	Ratchet	.89	1	34.85/ea
MSFTO2	17657	Orange	Ratchet	.89	1	34.85/ea
MSFTB2	17658	Blue	Ratchet	.89	1	34.85/ea



DUST MASK AND PARTICULATE RESPIRATOR

MDM1:

- Nuisance Dust Mask
- Aluminum nose bridge
- Single fabric elastic head band
- 50 masks per box

MDMPR1:

- Particulate Respirator
- NIOSH Approved N95
- Double straps
- Flexible nose piece
- 20 masks per box

PART#	UPC#	ITEM	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MDM1	17680	Nuisance Dust Mask	.59	50	24.55/ea
MDMPR1	17675	N95 Particulate Respirator	.53	20	63.74/ea

TOOLS, DRILLS AND ACCESSORIES



HEARING PROTECTION

- Contoured fit polyurethane ear plugs.
- Self adjusts to all size ear canals.
- Each pair is individually wrapped.
- MEPWC1 Ear Plugs with cords, 100 per box.


PART#	UPC#	ITEM	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MEPWC1	17896	Polyurethane Ear Plugs with Cord	.95	100	74.20/ea



WS02
2' Red Web Strap



 
WS04
4' Yellow Web Strap



WS06
6' Green Web Strap



 WS08
8' Purple Web Strap



WS10
10' Blue Web Strap



WS12
12' Black Web Strap

STRAP-IT® TIE-DOWNS

2WS02-2WS12



2-Packs

- Constructed of strong 1" webbing.
- Quick and convenient for securing loose tools and materials.
- Secure pipes, lumber, ladders, plywood, recreational loads and more.

PART#	UPC#	LENGTH	COLOR	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MWGWS02	28465	2'	Red	.15	1	9.88/ea
MWGWS04	28466	4'	Yellow	.15	1	11.75/ea
MWGWS06	28467	6'	Green	.25	1	13.63/ea
MWGWS08	28468	8'	Purple	.25	1	15.38/ea
MWGWS10	28469	10'	Blue	.30	1	17.20/ea
MWGWS12	28470	12'	Black	.30	1	19.00/ea
MWG2WS02	28457	2-Pack 2'	Red	.32	1	19.88/ea
MWG2WS04	28458	2-Pack 4'	Yellow	.37	1	23.50/ea
MWG2WS06	28459	2-Pack 6'	Green	.44	1	27.13/ea
MWG2WS08	28460	2-Pack 8'	Purple	.53	1	30.75/ea
MWG2WS10	28461	2-Pack 10'	Blue	.59	1	34.33/ea
MWG2WS12	28462	2-Pack 12'	Black	.66	1	37.88/ea



Metallics An **AMERICAN** Source For Premier and Innovative Fasteners and Anchors

We believe Metallics has the largest ratio of American made to foreign produced product of any other American fastener company.



TOOLS, DRILLS AND ACCESSORIES



STAPLE GUNS & STAPLES

MT-72



The MT72 is the ideal tool for installation of computer cable, dual RG-6 and non-metallic sheathed cable. The insulated C-UL-US listed staples meet current standards, are approved for jobsites, and won't crimp or damage the wire. Proudly made in the USA.

MT-59



The Pros' choice for installing data and communication cables. Whether installing Cat 5 cables, RG-59, or RG-6 cables this tool will secure the wires without crimping. A grooved wire guide tracks along the cable, speeding the work and preventing damage. Proudly made in the USA.

MT-25



The T25 is perfect for all low voltage wire applications including alarm systems, garage doors, thermostats, doorbells, and more. Proudly made in the USA.

MT-18



The MT18 staple gun is used for low voltage wiring up to 3/16-inch diameter. Built with steel construction and contains a grooved driving blade. It has a short span easy compression handle and our patented jam-resistant mechanism. Proudly made in the USA.

MT-37



The MT37 Wire Staple Gun is a specialty tool for professionals installing thermostats and low voltage communications wires in residential or commercial applications. Proudly made in the USA.

MT-50



The T50 is America's best-selling staple gun. Proudly made in the USA, It's the number one choice of generations of professionals and homeowners alike, the Arrow T50 has become legendary for its uniquely American blend of functionality, dependability, and sheer ruggedness.

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MT72	23672	Staple Gun	2.45	1	138.52/ea
M721168	23676	¹³ / ₆₄ x ³¹ / ₆₄ Insulated Staple	.52	300	28.21/c
M721189	23680	¹¹ / ₃₂ x ¹⁹ / ₃₂ Insulated Staple	.53	300	28.21/c
MT59	23659	Staple Gun	2.06	1	129.51/ea
M591168	23663	¹ / ₄ x ¹ / ₄ Clear	.28	300	21.16/ea
M591168BL	23668	¹ / ₄ x ¹ / ₄ Black	.28	300	21.16/ea
M591188	23664	⁵ / ₁₆ x ¹ / ₄ Clear	.27	300	21.16/ea
M591188BL	23669	⁵ / ₁₆ x ¹ / ₄ Black	.27	300	25.76/ea
M591189	23665	⁵ / ₁₆ x ⁵ / ₁₆ Clear Insulated Staple	.25	300	21.16/c
M591189BL	23670	⁵ / ₁₆ x ⁵ / ₁₆ Black Insulated Staple	.25	300	21.16/c
MT25	23625	Staple Gun	2.03	1	113.31/ea
M256	23630	¹ / ₄ x ³ / ₈ Non-insulated Staple	.27	1000	6.76/m
M256B	23756	¹ / ₄ x ³ / ₈ Staple Beige	.27	1000	6.76/m
M256RP	23631	¹ / ₄ x ³ / ₈ Monel Rust Proof	.29	1000	61.44/m
M257	23635	¹ / ₄ x ⁷ / ₁₆ Non-insulated Staple	.29	1000	6.76/m
M257B	23757	¹ / ₄ x ⁷ / ₁₆ Staple Beige	.30	1000	7.44/m
M257RP	23636	¹ / ₄ x ⁷ / ₁₆ Monel Rust Proof	.35	1000	78.89/m
M259	23640	¹ / ₄ x ⁹ / ₁₆ Non-insulated Staple	.37	1000	7.09/m
M259B	23759	¹ / ₄ x ⁹ / ₁₆ Staple Beige	.38	1000	7.79/m
M259RP	23641	¹ / ₄ x ⁹ / ₁₆ Monel Rust Proof	.44	1000	82.15/m
MT18	23605	Low Voltage Wire Staple Gun up to ³ / ₁₆	1.90	1	115.60/m
M186	23621	³ / ₁₆ x ³ / ₈ Staple	.26	1000	7.28/m
M187	23286	³ / ₁₆ x ⁷ / ₁₆ Staple	.28	1000	7.28/m
M187M	23607	³ / ₁₆ x ⁷ / ₁₆ Monel Staple	.32	1000	78.57/m
MT37	23637	Staple Gun with ⁵ / ₁₆ Crown Divergent Point	2.10	1	98.54/ea
M376	23639	⁵ / ₁₆ x ³ / ₈ Staple	.32	1000	8.86/m
M37916	23576	⁵ / ₁₆ x ⁹ / ₁₆ Staple	.40	1000	8.96/m
MT50	23644	Staple Gun-All purpose Heavy Duty (6 Staple Sizes)	2.04	1	74.99/ea
M50424	23645	¹ / ₄ x 6mm	.33	1250	8.53/ea
M50524	23646	⁵ / ₁₆ x 8mm	.37	1250	9.98/ea
M50624	23648	³ / ₈ x 10mm	.43	1250	11.59/ea
M50824	23650	¹ / ₂ x 12mm	.54	1250	12.25/ea
M50924	23652	⁹ / ₁₆ x 14mm	.65	1250	13.05/ea
M50CT24	23654	¹⁷ / ₃₂ x 13mm	.76	1250	13.53/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

www.metallics.us

TOOLS, DRILLS AND ACCESSORIES



TOMAHAWK STAPLER

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MTH50	23683	Arrow Tomahawk Stapler	2.17	1	98.16/ea

WIRE TACKERS

ARROW® MODEL T75™ WIRE & CABLE STAPLER

Uses T75™ Staples (5/8" (16mm) 7/8" (22mm))



- Durable Chrome Finish
- All-Steel Construction
- Cushioned Grip
- Grooved Guide
- Grooved Driving Blade
- Chrome Finish Resists Wear and Tear
- Patented Jam-Proof Mechanism
- Easy Squeeze Double Leverage Operation
- For wires up to 1/2" (12mm)
- NM Sheathed Cable up to #12 3-Wire
- CATV
- Communications
- Alarm Systems
- Electronics

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MT75	23675	Wire & Cable Staple Gun	2.20	1	109.32/ea
M759	23689	9/16 Staple	1.10	1000	21.26/m
M7510S	23693	5/8 Staple UL Listed	.98	1000	28.47/m
M7510	23590	5/8 Staple Not UL Listed	.84	1000	21.12/m
M7514S	23687	7/8 Staple UL Listed	1.10	1000	22.93/m
M7514	23594	7/8 Staple Not UL Listed	1.10	1000	23.25/m

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MIGHTY MARKER

6 ASSORTED COLORS!

Yellow • Blue • Red • White • Black • Green



- Permanent, waterproof and quick dry paint
- Indoor and outdoor
- Marks metal and most surfaces
- Medium line
- Aluminum barrel with paint-fed fiber tip
- Oil based opaque fast dry paint
- Fade and abrasion resistant
- Conforms to ASTM 4236

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MM01606	14637	Mighty Marker – 6 pack assorted colors	.34	6	36.38/ea
MM01612W	14639	12 pack White	.75	12	79.75/ea

TOOLS, DRILLS AND ACCESSORIES



9 IN 1 REGULAR BIT DRIVER SET

- **High Torque** coefficient will prevent the screwdriver from breaking when the tool is overstressed.
- **Cellulose Acetate** material provides highest performance.
- **TPV Cushion** grip provides slip resistance to chemical, oil and most solvents.

PART#	UPC#	SIZES	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD91	35042	2 Phillips Bits: #1, #2	.56	1	24.38/ea
		2 Slotted Bits: 3/16", 1/4"			
		2 TORX® Bits: T15, T20			
		3 Nut Drivers: 1/4", 5/16", 3/8"			



19 IN 1 RATCHETING SCREWDRIVER DRIVE SET

- **Torque** The torque is above 390lbs-in.
- **Ratchet** The ratchet permits high-speed action with grip adjustments and can be combined with popular driver ends.
- **The Perfect Handle Design** allows the handle to disperse the pressure evenly when applying force.

PART#	UPC#	SIZES	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD191	35043	3 Phillips Bits: #1, #2, #3	.85	1	34.38/ea
		3 Slotted Bits: 3/16", 1/4", 5/16"			
		4 TORX® Bits: T15, T20, T25, T30			
		2 Square Bits: #1, #2			
		4 Hex Bits: 1/8", 5/32", 3/16", 1/4"			
		3 Nut Drivers: 1/4", 5/16", 7/16"			



COUNTER SINK BITS SINGLE FLUTE

PART#	UPC#	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
CS14	12260	1/4	.03	1	11.03/ea
CS38	12261	3/8	.04	1	12.80/ea
CS12	12262	1/2	.06	1	16.24/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



ISOMAX® IMPACT DRIVER KIT

11 PIECE IMPACT DRIVER BIT KIT

Perfect for Removing Tight or Stuck Screws



Square Drive

- Perfect for Removing Tight, or Stuck Screws!
- Includes Comfortable Impact Absorbing Hand-Grip with Hand Guard
- Comes with Bit Holder, 9 Tips and Sturdy Molded Plastic Storage Case.

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
IBTK11	32771	11 pc. Impact Driver Kit with plastic Handle	2.20	1	59.20/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



Hex



Slotted



Phillips



Square Drive



ISOMAX® IMPACT DRIVER BIT KIT

13 PIECE IMPACT DRIVER BIT KIT

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
IBTK13	32773	13 pc. Impact Driver Bit Kit	.42	1	56.66/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

SIX-WAY SCREWDRIVER

SAME GREAT FEATURES AS OUR 4-WAY SCREWDRIVER

PLUS a hardened steel tube for use as a 1/4" or 5/16" hex nut driver!

 


5/16"

Hex Driver


1/4"

Hex Driver



SD6W1

 Includes:
3/16 & 9/32 Slotted bit
#1 & #2 Phillips bit



SD6W2

Includes:
#1 & #2 Square bit
#1 & #2 Phillips bit

- Reversible Steel Shaft with Hex Drivers
- Heavy Duty Black Plastic Handle with Gold Imprint

SPECIAL ORDER

PRIVATE LABELING AVAILABLE

with purchases of 72 or more drivers
(Specify handle color: Red, Black, Light Blue, Dark Blue, Yellow, Green)

Attractive counter display included with 12 or more!

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD6W1	35010	6-way Phillips and Slotted Points	.35	1	24.36/ea
SD6W2	35011	6-way Phillips and Square Points	.32	1	24.36/ea
MSRB61	12875	No. 1 & No. 2 Double End Phil Bit	.03	1	7.73/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

 
TOOLS, DRILLS AND ACCESSORIES

FOUR-WAY SCREWDRIVER

CONVENIENCE OF 4 SCREWDRIVERS IN ONE!




Attractive counter display included with 12 or more!



SD4W1

 Includes:
3/16 & 9/32 Slotted bit
#1 & #2 Phillips bit



SD4W2

Includes:
#1 & #2 Square bit
#1 & #2 Phillips bit

- Reversible Shaft
- Heavy Duty Black Plastic Handle with Gold Imprint

SPECIAL ORDER

PRIVATE LABELING AVAILABLE

with purchases of 72 or more drivers
(Specify handle color: Red, Black, Light Blue, Dark Blue, Yellow, Green)

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD4W1	35001	4-way Phillips and Slotted Points	.32	1	19.90/ea
SD4W2	35002	4-way Phillips and Square Points	.31	1	19.90/ea
MSRB45	12872	3/16 Slotted and 9/32 Slot	.03	1	5.48/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

15-IN-1 RATCHET SCREWDRIVER

Handle Contains 1 each of bits listed below



PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD15B	35025	Screwdriver	.50	1	63.76/ea
15-1 REPLACEMENT BITS (PKG. 6 BITS PER PKG.)					
SDR1B	35028	1/8 Slotted x #0 Phillips	.50	6	38.55/ea
SDR2B	35030	1/4 x 3/16 Slotted	.50	6	38.55/ea
SDR3B	35032	1/4 Slotted x #2 Phillips	.50	6	38.55/ea
SDR4B	35034	5/32 Slotted x #3 Phillips	.50	6	38.55/ea
SDR5B	35036	#1 x #2 Phillips	.50	6	38.55/ea
SDR6B	35038	T15 x T20 Torx Compatible	.50	6	46.73/ea
SDR7B	35040	S1 x S2 Square	.50	6	46.73/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



25' PRO TAPE MEASURE

CUSHION GRIP PROVIDES NON-SLIP GRIP AND HELPS PROTECT TAPE

Quick release and locking button

Tape 7/8" wide for extra strength

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MPT1	31304	Tape Measure	.79	1	47.01/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

LUTZ® IS A REGISTERED TRADEMARK

TOOLS, DRILLS AND ACCESSORIES



UTILITY KNIFE

HEAVY DUTY • XTRA BLADES IN HANDLE • RETRACTABLE BLADE

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MUK1	31308	Utility Knife	.48	1	22.71/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



THREE-IN-ONE TAP THREAD CLEANING TOOL

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
681032	16345	6-32,8-32,10-32 Thread Cleaning Tool	.21	1	31.61/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

HIGH-SPEED TWIST DRILLS

FRACTIONAL SIZES

Individually Packaged



- Jobber length - 118° Point
- Fractional sizes
- Bright finish
- In single pouch

PART#	UPC#	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSD1E	39801	1/16	1 7/8	.003	1	2.14/ea
HSD2E	39802	5/64	2	.004	1	2.14/ea
HSD3E	39803	3/32	2 1/4	.01	1	2.17/ea
HSD4E	39804	7/64	2 5/8	.01	1	2.20/ea
HSD5E	39805	1/8	2 3/4	.01	1	2.48/ea
HSD6E	39806	9/64	2 7/8	.01	1	2.69/ea
HSD7E	39807	5/32	3 1/8	.01	1	2.72/ea
HSD8E	39808	11/32	3 1/4	.02	1	3.06/ea
HSD9E	39809	3/16	3 1/2	.03	1	3.54/ea
HSD29E	39829	13/64	3 5/8	.03	1	3.96/ea
HSD10E	39810	7/32	3 3/4	.03	1	4.19/ea
HSD11E	39811	15/64	3 7/8	.04	1	4.61/ea
HSD12E	39812	1/4	4	.04	1	5.38/ea
HSD13E	39813	17/64	4 1/8	.06	1	6.33/ea
HSD14E	39814	9/32	4 1/4	.06	1	7.43/ea
HSD15E	39815	19/64	4 3/8	.06	1	7.87/ea
HSD16E	39816	5/16	4 1/2	.07	1	8.10/ea
*HSD16RE	39916	5/16	4	.06	1	8.95/ea
HSD17E	39817	21/64	4 5/8	.08	1	8.61/ea
HSD18E	39818	11/32	4 3/4	.09	1	10.07/ea
HSD19E	39819	23/64	4 7/8	.10	1	11.41/ea
HSD20E	39820	3/8	5	.11	1	11.76/ea
*HSD20RE	39920	3/8	4	.09	1	12.43/ea
HSD21E	39821	25/64	5 1/8	.12	1	12.51/ea
HSD22E	39822	13/32	5 1/4	.13	1	13.41/ea
HSD23E	39823	27/64	5 3/8	.14	1	14.83/ea
HSD24E	39824	7/16	5 1/2	.16	1	15.44/ea
*HSD24RE	39924	7/16	4	.16	1	15.85/ea
HSD25E	39850	29/64	5 5/8	.17	1	18.61/ea
HSD26E	39826	15/32	5 3/4	.18	1	17.94/ea
HSD27E	39827	31/64	5 7/8	.20	1	19.11/ea
HSD28E	39828	1/2	6	.24	1	19.88/ea
*HSD28RE	39928	1/2	4	.14	1	20.73/ea
HSD29R38E	24463	1/2	4 1/2	.18	1	28.20/ea
HSD916E	24466	9/16	8 1/4	.31	1	38.73/ea
HSD58E	24467	5/8	8 3/4	.31	1	44.58/ea
HSD116E	24383	11/16	9 1/4	.38	1	42.14/ea
HSD34E	24476	3/4	9 3/4	.41	1	66.56/ea

*1/4 reduced shank

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.

TOOLS, DRILLS AND ACCESSORIES

HIGH-SPEED TWIST DRILLS

NUMBERED SIZES

Individually Packaged



- Jobber length - 118° Point
- Numbered sizes
- Black oxide finish
- In single pouch

PART	UPC	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
NHSD6E	39706	6	3 ³ / ₄	.04	1	4.88/ea
NHSD7E	39707	7	3 ⁵ / ₈	.02	1	4.61/ea
NHSD8E	39708	8	3 ⁵ / ₈	.02	1	4.12/ea
NHSD9E	39709	9	3 ⁵ / ₈	.02	1	4.07/ea
NHSD10E	39710	10	3 ⁵ / ₈	.04	1	3.94/ea
NHSD11E	39711	11	3 ¹ / ₂	.02	1	3.94/ea
NHSD20E	39720	20	3 ¹ / ₄	.03	1	3.21/ea
NHSD21E	39721	21	3 ¹ / ₄	.01	1	3.34/ea
NHSD22E	39722	22	3 ¹ / ₈	.01	1	2.93/ea
NHSD25E	39725	25	3	.01	1	2.90/ea
*NHSD25SE	24848	25	2 ¹ / ₁₆	.01	1	2.30/ea
NHSD26E	39726	26	3	.01	1	2.90/ea
NHSD28E	39728	28	2 ⁷ / ₈	.01	1	2.93/ea
NHSD29E	39729	29	2 ⁷ / ₈	.01	1	2.93/ea
NHSD30E	39730	30	2 ³ / ₄	.01	1	2.93/ea
NHSD31E	39731	31	2 ³ / ₄	.01	1	2.93/ea
NHSD35E	39735	35	2 ⁵ / ₈	.01	1	2.93/ea
NHSD36E	39736	36	2 ¹ / ₂	.01	1	2.93/ea
NHSD37E	39737	37	2 ¹ / ₂	.01	1	2.26/ea
NHSD43E	39743	43	2 ¹ / ₄	.01	1	2.26/ea
NHSD45E	39745	45	2 ¹ / ₈	.01	1	3.34/ea

*ZINC FINISH.

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.



HIGH-SPEED TWIST DRILLS

JOBBER LENGTH

WIRE GAUGE SIZES • LETTER SIZES

PART#	UPC#	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WIRE GAUGE SIZES 118° POINTS						
NHSD2	24802	#2	3 ⁷ / ₈	.29	10	12.92/ea
NHSD3	24803	#3	3 ³ / ₄	.25	10	36.36/ea
NHSD4	24804	#4	3 ³ / ₄	.23	10	18.20/ea
NHSD5	24805	#5	3 ³ / ₄	.23	10	20.44/ea
NHSD6	24806	#6	3 ³ / ₄	.40	10	45.88/ea
NHSD7	24807	#7	3 ⁵ / ₈	.20	10	43.46/ea
NHSD8	24808	#8	3 ⁵ / ₈	.21	10	38.55/ea
NHSD9	24809	#9	3 ⁵ / ₈	.37	10	37.69/ea
NHSD10	24810	#10	3 ⁵ / ₈	.22	10	36.08/ea
NHSD11	24811	#11	3 ¹ / ₂	.22	10	36.08/ea
NHSD14	24814	#14	3 ³ / ₈	.18	10	18.75/ea
NHSD16	24816	#16	3 ³ / ₈	.15	10	21.25/ea
NHSD17	24817	#17	3 ³ / ₈	.13	10	23.75/ea
NHSD18	24818	#18	3 ¹ / ₄	.12	10	25.00/ea
NHSD19	24819	#19	3 ¹ / ₄	.12	10	27.44/ea
NHSD20	24820	#20	3 ¹ / ₄	.25	10	29.51/ea
NHSD21	24821	#21	3 ¹ / ₄	.14	10	30.34/ea
NHSD22	24822	#22	3 ¹ / ₈	.13	10	26.65/ea
NHSD23	24823	#23	3 ¹ / ₈	.12	10	30.88/ea
NHSD24	24824	#24	3 ¹ / ₈	.12	10	33.32/ea
NHSD25	24825	#25	3	.12	10	25.82/ea
NHSD26	24826	#26	3	.11	10	25.82/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CONTINUED ON NEXT PAGE
www.metallics.us

TOOLS, DRILLS AND ACCESSORIES

CONTINUED

HIGH-SPEED TWIST DRILLS

JOBBER LENGTH

WIRE GAUGE SIZES • LETTER SIZES



PART#	UPC#	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WIRE GAUGE SIZES 118° POINTS						
NHSD27	24827	#27	3	.08	10	22.20/ea
NHSD28	24828	#28	2 ⁷ / ₈	.10	10	26.65/ea
NHSD29	24829	#29	2 ⁷ / ₈	.10	10	26.65/ea
NHSD29SE	24849	#29	1 ¹⁵ / ₁₆	.02	1	1.75/ea
NHSD30	24830	#30	2 ³ / ₄	.08	10	26.65/ea
NHSD31	24831	#31	2 ³ / ₄	.08	10	26.65/ea
NHSD32	35435	#32	2 ³ / ₄	.08	10	17.92/ea
NHSD33	24833	#33	2 ⁵ / ₈	.07	10	19.74/ea
NHSD35	24835	#35	2 ⁵ / ₈	.07	10	26.65/ea
NHSD36	24836	#36	2 ¹ / ₂	.06	10	26.65/ea
NHSD37	24837	#37	2 ¹ / ₂	.06	10	20.08/ea
NHSD39	24839	#39	2 ³ / ₈	.05	10	25.48/ea
NHSD41	24841	#41	2 ³ / ₈	.05	10	27.55/ea
NHSD43	24843	#43	2 ¹ / ₄	.05	10	20.08/ea
NHSD44	24844	#44	2 ¹ / ₈	.04	10	25.48/ea
NHSD50	25150	#50	2	.03	10	25.48/ea
NHSD77E	24813	#77	7 ⁷ / ₈	.01	1	1.99/ea
LETTER SIZES						
HSDFE	28406	F	4 ¹ / ₈	.05	1	4.96/ea
NHSDNE	35458	N	4 ³ / ₈	.07	1	14.90/ea
HSDQE	28417	Q	4 ³ / ₄	.08	1	7.95/ea
NHSDUE	35459	U	5	.09	1	25.62/ea
NHSDZE	35460	Z	5 ¹ / ₄	.10	1	30.55/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

HIGH-SPEED TWIST DRILLS

JOBBER LENGTH

FRACTIONAL SIZES



PART#	UPC#	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
FRACTIONAL SIZES 118° POINTS						
HSD31	24472	3 ³ / ₆₄	1 ³ / ₄	.02	5	19.47/ea
HSD1	24300	1 ¹ / ₁₆	1 ⁷ / ₈	.03	10	19.29/ea
HSD2	24305	5 ⁵ / ₆₄	2	.04	10	19.29/ea
HSD3	24310	3 ³ / ₃₂	2 ¹ / ₄	.05	10	19.69/ea
HSD4	24315	7 ⁷ / ₆₄	2 ⁵ / ₈	.07	10	19.69/ea
HSD5	24320	1 ¹ / ₈	2 ³ / ₄	.09	10	22.15/ea
HSD6	24325	9 ⁹ / ₆₄	2 ⁷ / ₈	.11	10	24.20/ea
HSD7	24330	5 ⁵ / ₃₂	3 ¹ / ₈	.14	10	24.60/ea
HSD8	24335	11 ¹¹ / ₆₄	3 ¹ / ₄	.17	10	27.87/ea
HSD9	24340	3 ³ / ₁₆	3 ¹ / ₂	.21	10	32.38/ea
HSD29	24345	13 ¹³ / ₆₄	3 ⁵ / ₈	.26	10	36.90/ea
HSD10	24350	7 ⁷ / ₃₂	3 ³ / ₄	.26	10	38.94/ea
HSD11	24355	15 ¹⁵ / ₆₄	3 ⁷ / ₈	.35	10	42.60/ea
HSD12	24360	1 ¹ / ₄	4	.41	10	50.02/ea
HSD13	24365	17 ¹⁷ / ₆₄	4 ¹ / ₈	.29	5	29.51/ea
HSD14	24370	9 ⁹ / ₃₂	4 ¹ / ₄	.28	5	34.68/ea
HSD15	24375	19 ¹⁹ / ₆₄	4 ³ / ₈	.32	5	36.90/ea
HSD16	24380	5 ⁵ / ₁₆	4 ¹ / ₂	.36	5	37.93/ea

INCLUDED
IN HSCD1
DRILL
DISPLAY
SEE PAGE 249

*1/4 reduced shank

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CONTINUED ON NEXT PAGE

www.metallics.us

TOOLS, DRILLS AND ACCESSORIES

CONTINUED

HIGH-SPEED TWIST DRILLS

JOBBER LENGTH
FRACTIONAL SIZES



PART#	UPC#	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
FRACTIONAL SIZES 118° POINTS					Con't from Page 246	
*HSD16R	24385	5/16	3 13/16	.32	NOT INCLUDED	42.00/ea
HSD17	24390	21/64	4 5/8	.39		42.21/ea
HSD18	24395	11/32	4 3/4	.44		47.91/ea
HSD19	24400	23/64	4 7/8	.48		53.87/ea
HSD20	24405	3/8	5	.55		55.33/ea
*HSD20R	24410	3/8	4	.43	NOT INCLUDED	58.63/ea
HSD21	24415	25/64	5 1/8	.60		59.43/ea
HSD22	24420	13/32	5 1/4	.64		63.11/ea
HSD23	24425	27/64	5 3/8	.72		70.08/ea
HSD24	24430	7/16	5 1/2	.82		74.80/ea
*HSD24R	24435	7/16	4 11/16	.78	NOT INCLUDED	72.95/ea
HSD25	24440	29/64	5 5/8	.86		88.14/ea
HSD26	24445	15/32	5 3/4	.89		84.85/ea
HSD27	24450	31/64	5 7/8	1.00		90.37/ea
HSD28	24455	1/2	6	1.16		94.04/ea
*HSD28R	24460	1/2	4	.07	NOT INCLUDED	98.12/ea

*1/4 reduced shank

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

HEAVY DUTY COBALT STEEL 135° SPLIT POINT DRILLS

FRACTIONAL SIZES
Individually Packaged



PART	UPC	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSSC1E	28201	1/16	1 7/8	.01	1	3.53/ea
HSSC2E	28202	5/64	2	.01	1	3.95/ea
HSSC3E	28203	3/32	2 1/4	.01	1	4.31/ea
HSSC4E	28204	7/64	2 5/8	.01	1	4.54/ea
HSSC5E	28205	1/8	2 3/4	.02	1	5.13/ea
HSSC6E	28206	9/64	2 7/8	.02	1	5.54/ea
HSSC7E	28207	5/32	3 1/8	.02	1	6.08/ea
HSSC8E	28208	11/64	3 1/4	.03	1	6.42/ea
HSSC9E	28209	3/16	3 1/2	.03	1	7.06/ea
HSSC29E	28229	13/64	3 5/8	.03	1	9.33/ea
HSSC10E	28210	7/32	3 3/4	.04	1	9.95/ea
HSSC11E	28211	15/64	3 7/8	.05	1	10.94/ea
HSSC12E	28212	1/4	4	.05	1	11.89/ea
HSSC13E	28213	17/64	4 1/8	.05	1	12.82/ea
HSSC14E	28214	9/32	4 1/4	.06	1	14.06/ea
HSSC15E	28215	19/64	4 3/8	.06	1	16.18/ea
HSSC16E	28216	5/16	4 1/2	.08	1	17.39/ea
HSSC17E	28217	21/64	4 5/8	.08	1	19.07/ea
HSSC18E	28218	11/32	4 3/4	.08	1	22.01/ea
HSSC19E	28219	23/64	4 7/8	.10	1	25.07/ea
HSSC20E	28220	3/8	5	.13	1	26.24/ea

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.

- Cobalt Steel
- Jobber Length - 135° Point
- Fractional Sizes
- Yellow Finish
- In Single Pouch

USES

- Hardened Steel
- Stainless Steel
- High Temp Alloys
- Heat Treated Material
- Abrasive Plastics
- Titanium

CONTINUED ON NEXT PAGE
www.metallics.us

TOOLS, DRILLS AND ACCESSORIES

CONTINUED

HEAVY DUTY COBALT STEEL 135° SPLIT POINT DRILLS

FRACTIONAL SIZES

Individually Packaged

- Cobalt Steel
- Jobber Length - 135° Point
- Fractional Sizes
- Yellow Finish
- In Single Pouch

USES

- Hardened Steel
- Stainless Steel
- High Temp Alloys
- Heat Treated Material
- Abrasive Plastics
- Titanium

PART	UPC	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSSC21E	28221	²⁵ / ₆₄	5 ¹ / ₈	.12	1	27.64/ea
HSSC22E	28222	¹³ / ₃₂	5 ¹ / ₄	.13	1	29.55/ea
HSSC23E	28223	²⁷ / ₆₄	5 ³ / ₈	.15	1	31.23/ea
HSSC24E	28224	⁷ / ₁₆	5 ¹ / ₂	.19	1	32.51/ea
HSSC25E	28225	²⁹ / ₆₄	5 ⁵ / ₈	.19	1	38.92/ea
HSSC26E	28226	¹⁵ / ₃₂	1 ⁵ / ₄	.19	1	39.70/ea
HSSC27E	28227	³¹ / ₆₄	5 ⁷ / ₈	.20	1	40.63/ea
HSSC28E	28228	¹ / ₂	6	.26	1	41.83/ea

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.

HEAVY DUTY COBALT STEEL 135° SPLIT POINT DRILLS

WIRE GAUGE SIZES

Individually Packaged

- Cobalt Steel
- Jobber Length - 135° Point
- Wire Gauge Sizes
- Yellow Finish
- In Single Pouch

USES

- Hardened Steel
- Stainless Steel
- High Temp Alloys
- Heat Treated Material
- Abrasive Plastics
- Titanium

PART#	UPC#	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSSCN6E	28306	#6	3 ³ / ₄	.04	1	11.03/ea
HSSCN7E	28307	#7	3 ⁵ / ₈	.02	1	8.29/ea
HSSCN8E	28308	#8	3 ⁵ / ₈	.02	1	8.23/ea
HSSCN9E	28309	#9	3 ⁵ / ₈	.02	1	8.18/ea
HSSCN10E	28310	#10	3 ⁵ / ₈	.02	1	8.12/ea
HSSCN11E	28311	#11	3 ¹ / ₂	.01	1	8.06/ea
HSSCN20E	28320	#20	3 ¹ / ₄	.01	1	6.08/ea
HSSCN21E	28321	#21	3 ¹ / ₄	.01	1	6.03/ea
HSSCN22E	28322	#22	3 ¹ / ₈	.01	1	5.97/ea
HSSCN25E	28325	#25	3	.01	1	5.88/ea
HSSCN26E	28326	#26	3	.01	1	5.82/ea
HSSCN27E	27389	#27	3	.01	1	8.95/ea
HSSCN28E	28328	#28	2 ⁷ / ₈	.01	1	5.77/ea
HSSCN29E	28329	#29	2 ⁷ / ₈	.01	1	5.71/ea
HSSCN30E	28330	#30	2 ³ / ₄	.01	1	5.66/ea
HSSCN31E	28331	#31	2 ³ / ₄	.01	1	5.60/ea
HSSCN32E	27392	#32	2 ³ / ₄	.01	1	8.95/ea
HSSCN35E	28335	#35	2 ⁵ / ₈	.01	1	5.54/ea
HSSCN36E	28336	#36	2 ¹ / ₂	.01	1	5.58/ea
HSSCN37E	28337	#37	2 ¹ / ₂	.01	1	5.49/ea
HSSCN43E	28343	#43	2 ¹ / ₄	.01	1	5.43/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

Helpful Hints From Metallics:

Did You forget to ask?

GOT FASTENERS?

TOOLS, DRILLS AND ACCESSORIES



MAGNETIC BIT AND NUT SETTER KIT

- Three sizes of Nut Setters and one size Bit Holders
- Magnetized for ease of use
- Be professional, be prepared

PART#	UPC#	DESCRIPTION	SIZE	QTY. EACH	WT. PER PKG.	STD. PKG./MSTR. SLEEVE	SUGGESTED TRADE LIST PRICE PER
MTKQ	10890	Mag. Hex Bit Holder	1/4 x 2	2	.80	1	85.46/ea kit
		Mag Nut Setter	1/4 x 2	2			
		Mag Nut Setter	5/16 x 2	2			
		Mag Nut Setter	3/8 x 2	2			

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



EXTRA LONG POWER BITS

PART#	UPC#	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MT208L4	27150	1/4	4	.22	2	21.84/ea
MT208L6	27155	1/4	6	.36	2	25.91/ea
MT210L4	10523	5/16	4	.20	2	24.90/ea
MT210L6	10526	5/16	6	.22	2	38.34/ea
MT212L4	27165	3/8	4	.25	2	27.72/ea
MT212L6	27170	3/8	6	.39	2	49.56/ea
MT208L4B	27151	1/4	4	.11	1	12.60/ea
MT208L6B	27156	1/4	6	.16	1	15.40/ea
MT210L4B	10524	5/16	4	.11	1	12.44/ea
MT210L6B	10527	5/16	6	.07	1	19.16/ea
MT212L4B	27166	3/8	4	.13	1	16.52/ea
MT212L6B	27171	3/8	6	.18	1	31.08/ea

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.



HIGH-SPEED DRILL COUNTER DISPLAY

An attractive, compact "Point of Purchase" Display, 15" wide x 13" high x 8" deep. Improve sales by providing speedy selection of your complete range of high-speed drills.

- Strong metal construction
- Transparent hinged cover with lock prevents theft

Display contains standard package quantities of all 29 HSD fractional drill sizes in jobber lengths, standard shank, a total of 210 drills.

Fractional Drills For HSCD1 Counter Display

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSCD1	24515	Display and 210 Assorted HSD drills	23.60	1 Display	1,294.90/ea

TOOLS, DRILLS AND ACCESSORIES



SELECT-A-DRILL

SAD13 - 13 Piece Select-A-Drill Kit

Thirteen (13) high-speed jobber length drills from $\frac{1}{16}$ " to $\frac{1}{4}$ " by 64ths. Popular sizes in a unique rotating case

SAD21 - 21 Piece Select-A-Drill Kit

Twenty-one (21) high-speed jobber length drills from $\frac{1}{16}$ " to $\frac{3}{8}$ " by 64ths. Popular sizes in a unique rotating case

118° POINT



PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SAD13	24520	.32	1	36.22/ea kit
SAD21	24525	.90	1	93.36/ea kit



HIGH-SPEED DRILL KITS

PART#	UPC#	QTY. DRILLS	DRILL SIZES	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSDK1	24510	29	$\frac{1}{16}$ – $\frac{1}{2}$ by 1/64ths 135°	3.35	1	180.08/ea kit
HSDK2	24505	15	$\frac{1}{16}$ – $\frac{1}{2}$ by 1/32nds 135°	2.05	1	95.15/ea kit
HSDK3	24500	13	$\frac{1}{16}$ – $\frac{1}{4}$ by 1/64ths 135°	.65	1	31.20/ea kit
HSDK5	24535	29	$\frac{1}{16}$ – $\frac{1}{2}$ by 1/64ths 135°	3.35	1	609.20/ea kit
HSDK6	24536	8	$\frac{9}{16}$ – 1 118°	5.84	1	576.00/ea kit
HSDK8	24518	8	$\frac{9}{16}$ – 1 118°	5.04	1	327.63/ea kit
HSDK21	24512	21	$\frac{1}{16}$ – $\frac{3}{8}$ by 1/64ths 135°	1.34	1	82.00/ea kit



9 Piece Nut Setter Kit
(MTKQ9)

10 Piece Nut Setter Kit
(MTKQ10)

MAGNETIC BIT HOLDER AND NUT SETTER KITS


- Each kit contains one of each of the following:
 - $\frac{1}{4}$ x $1\frac{5}{8}$ magnetic nut setter,
 - $\frac{1}{4}$ x $\frac{29}{16}$ magnetic nut setter,
 - $\frac{1}{4}$ x 4 magnetic nut setter,
 - $\frac{1}{4}$ x 6 magnetic nut setter,
 - $\frac{5}{16}$ x $1\frac{5}{8}$ magnetic nut setter,
 - $\frac{5}{16}$ x $\frac{29}{16}$ magnetic nut setter,
 - $\frac{5}{16}$ x 4 magnetic nut setter,
 - $\frac{5}{16}$ x 6 magnetic nut setter, and
 - $\frac{3}{8}$ x $1\frac{5}{8}$ magnetic nut setter.
- The MTKQ10 also includes a $\frac{1}{4}$ quick change drill chuck adapter.
- All pieces come in a handy X-Large 6 compartment poly box.

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MTKQ9	13246	9 Piece Magnetic Bit Holder and Nut Setter Kit	1.30	1	98.28/ea kit
MTKQ10	13251	10 Piece Magnetic Bit Holder and Nut Setter Kit	1.39	1	103.32/ea kit
DCA1	32764	$\frac{1}{4}$ Quick Change Drill Chuck Adapter	.07	1	10.92/ea

TOOLS, DRILLS AND ACCESSORIES

STOP GUESSING!

NUT & BOLT GAUGE

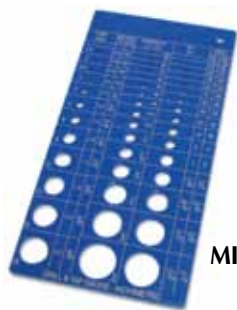


MISTG1

MISTG1

- Internal thread screw gauge measures inch and metric, course & fine.
- Tap drill chart for inch & metric.

MNBG1

- Measures inch and metric bolts, nuts, screws, drill bits and washers.
- Inch and metric screw chart.

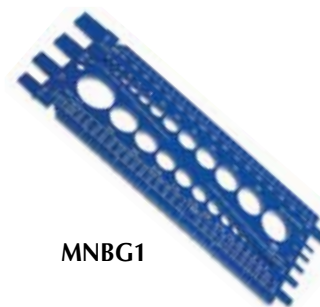

MNBG1

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MNBG1	16450	Nut & Bolt Gauge (Inch & Metric)	.15	1	10.90/ea
MISTG1	16452	Internal Thread Gauge (Inch & Metric)	.12	1	11.65/ea



POWER BITS AND MAGNETIC HOLDERS

PART#	UPC#	DESCRIPTION	LENGTH	WT. PER PKG.	STD. PKG./MSTR. SLEEVE	SUGGESTED TRADE LIST PRICE PER
000P1X	25070	#1 Phillips Insert Bit	1	.18	10	15.14/ea
000P2X	25074	#2 Phillips Insert Bit	1	.19	10	15.14/ea
000P3X	25080	#3 Phillips Insert Bit	1	.19	10	15.14/ea
000R2X	25055	#2 Square Drive Insert Bit	1	.19	10	18.07/ea
0016X	25235	6-8 Slotted Insert Bit	1	.19	10	24.55/ea
0018X	25240	8-10 Slotted Insert Bit	1	.19	10	24.55/ea
00110X	25245	10-12 Slotted Insert Bit	1	.19	10	24.55/ea
100P1X	25300	#1 Phillips Power Bit	2	.17	5	17.81/ea
100P2X	25305	#2 Phillips Power Bit	2	.19	5	17.81/ea
100P3X	25312	#3 Phillips Power Bit	2	.20	5	18.28/ea
1008X	25415	8-10 Slotted Power Bit	2	.21	5	28.26/ea
10010X	25314	10-12 Slotted Power Bit	2	.21	5	30.61/ea
P2P2	25510	#2 Phillips Dbl Ended Bit	1¾	.11	2	16.93/ea
P2S8	25505	#2 Phillips Slotted Dbl End	1½	.18	2	10.94/ea

MAGNETIZED

MT208	10870	¼ Drill Chuck Nut Setter	1¾	.15	2	18.54/ea
MT208L	10875	¼ Drill Chuck Long Nut Setter	2⅞	.20	2	22.42/ea
MT210	10871	⅝ ₁₆ Drill Chuck Nut Setter	1¾	.12	2	22.42/ea
MT210L	10876	⅝ ₁₆ Drill Chuck Long Nut Setter	2⅞	.22	2	24.86/ea
MT212	10872	⅜ Drill Chuck Nut Setter	1¾	.18	2	24.62/ea
MT212L	10877	⅜ Drill Chuck Long Nut Setter	2⅞	.25	2	28.76/ea
MT214L	10529	7 ₁₆ Drill Chuck Long Nut Setter	2⅞	.05	1	19.80/ea
M10	25250	¼ Hex Insert Bit Holder	2⅞	.16	1	24.65/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

1/4" HEX SHANK SCREWDRIVER POWER BITS AND HOLDERS

	PART#	UPC#	SCREW SIZE	POINT SIZE	OVERALL LENGTH	WT. PER PKG.	QTY	SUGGESTED TRADE LIST PRICE PER
PHILLIPS INSERT & POWER BITS 	000P1B	25071	4-6	#1	1	.01	1	1.38/ea
	000P2B	25076	8-10	#2	1	.01	1	1.38/ea
	000P2BB	25077	8-10	#2	1	.61	50	54.60/ea
	000P2R	25026	8-10	#2	1	.01	1	2.13/ea
	000P3B	25081	12-14	#3	1	.01	1	1.38/ea
	001P2B	25085	8-10	#2	1 1/4	.02	1	2.95/ea
	100P1B	25301	4-6	#1	2	.02	1	3.17/ea
	100P2B	25306	8-10	#2	2	.02	1	3.17/ea
	100P3B	25310	12-14	#3	2	.02	1	2.89/ea
	125P1B	25315	4-6	#1	3	.02	1	3.73/ea
	125P2B	25320	8-10	#2	3	.04	1	4.17/ea
	125P3B	25325	12-14	#3	3	.03	1	4.74/ea
	140P1B	25345	4-6	#1	4	.04	1	5.26/ea
	140P2B	25350	8-10	#2	4	.05	1	5.26/ea
	140P3B	25355	12-14	#3	4	.05	1	5.26/ea
	160P1B	25333	4-6	#1	6	.05	1	12.32/ea
	160P2B	25351	8-10	#2	6	.06	1	11.00/ea
	160P3B	27340	12-14	#3	6	.09	1	7.78/ea
SLOTTED INSERT & POWER BITS 	0001B	25211	0-1	0-1	1	.01	1	7.50/ea
	00112B	25246	2-3	2-3	1	.01	1	3.65/ea
	0014B	25225	4-5	4-5	1	.01	1	2.23/ea
	0016B	25236	6-8	6-8	1	.01	1	2.23/ea
	0018B	25241	8-10	8-10	1	.01	1	2.23/ea
	00110B	25206	10-12	10-12	1	.01	1	2.23/ea
	0004B	25190	4-5	4-5	1 1/2	.02	1	2.07/ea
	0006B	25195	6-8	6-8	1 1/2	.02	1	2.89/ea
	0008B	25200	8-10	8-10	1 1/2	.03	1	2.89/ea
	00010B	25205	10-12	10-12	1 1/2	.03	1	2.89/ea
	1004B	25400	4-5	4-5	2	.02	1	4.70/ea
	1005B	12279	5-6	5-6	2	.02	1	6.24/ea
	1006B	25410	6-8	6-8	2	.03	1	4.70/ea
	1008B	25416	8-10	8-10	2	.03	1	5.26/ea
	10010B	25420	10-12	10-12	2	.03	1	5.64/ea
	1254B	25322	4-5	4-5	3	.04	1	6.24/ea
	1256B	25440	6-8	6-8	3	.04	1	6.65/ea
	1258B	25445	8-10	8-10	3	.04	1	7.15/ea
	12510B	25450	10-12	10-12	3	.05	1	9.84/ea
	12512B	25455	12-14	12-14	3	.06	1	8.48/ea
	1408B	27330	8-10	8-10	4	.05	1	6.94/ea
	1608B	27335	8-10	8-10	6	.12	1	8.77/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CONTINUED ON NEXT PAGE

.....
Metallics was the first in America to offer the Combo Head — 1985


TOOLS, DRILLS AND ACCESSORIES

CONTINUED

1/4" HEX SHANK SCREWDRIVER POWER BITS AND HOLDERS

	PART#	UPC#	SCREW SIZE	POINT SIZE	OVERALL LENGTH	WT. PER PKG.	QTY	SUGGESTED TRADE LIST PRICE PER
SQUARE DRIVE INSERT BITS 	000R1B	25050	4-6	#1	1	.01	1	1.66/ea
	000R2B	25056	8-10	#2	1	.01	1	1.66/ea
	000R3B	25060	12-14	#3	1	.01	1	1.66/ea
	100R1B	25065	4-6	#1	2	.01	1	3.26/ea
	100R2B	25072	8-10	#2	2	.02	1	3.26/ea
	100R3B	25075	12-14	#3	2	.02	1	3.26/ea
	125R1B	10149	4-6	#1	3	.03	1	5.71/ea
	125R2B	10166	8-10	#2	3	.04	1	5.71/ea
	125R3B	10167	12-14	#3	3	.04	1	5.71/ea
	140R1B	10176	4-6	#1	4	.04	1	8.19/ea
	140R2B	10177	8-10	#2	4	.05	1	9.13/ea
	140R3B	10180	12-14	#3	4	.05	1	9.13/ea
	160R1B	27345	6-8	#1	6	.03	1	9.24/ea
	160R2B	25352	8-10	#2	6	.07	1	10.89/ea
	160R3B	25357	12-14	#3	6	.07	1	10.89/ea
DOUBLE ENDED INSERT BITS 	180R2B	10193	8-10	#2	8	.11	1	11.73/ea
	110R2B	10175	8-10	#2	12	.12	1	12.10/ea
	P1P1B	17862	#1 Phil/#1 Phil	2	.02	.02	1	6.97/ea
	P2P2B	10178	#2 Phil/#2 Phil	2	.02	.02	1	7.75/ea
SPANNER INSERT BITS 	P2S8B	10179	#2 Phil/8-10 Slot	1 3/4	.02	.02	1	3.92/ea
	41SQ	28975	#1 Square/#2 Square	2	.04	.04	1	7.75/ea
MAGNETIC BIT HOLDER & NUT SETTERS 	00SP6B	25027	Spanner	#6	1	.01	1	6.31/ea
	00SP8B	10195	Spanner	#8	1	.01	1	6.31/ea
	00SP10B	10196	Spanner	#10	1	.04	1	6.31/ea
	M1B	25260	1/4 Mag Bit Hldr	1 3/4	.04	.04	1	18.88/ea
	M10B	25255	1/4 Mag Bit Hldr	2 7/8	.08	.08	1	22.20/ea
	M14B	27350	1/4 Mag Bit Hldr	4	5.36	5.36	1	21.00/ea
	M16B	27355	1/4 Mag Bit Hldr	6	5.93	5.93	1	40.26/ea
	MT208B	10183	1/4 Mag Nut Setter	1 5/8	.04	.04	1	8.40/ea
	MT208LB	10186	1/4 Mag Nut Setter	2 9/16	.06	.06	1	10.16/ea
	MT210B	10184	5/16 Mag Nut Setter	1 5/8	.05	.05	1	9.44/ea
	MT210LB	10187	5/16 Mag Nut Setter	2 9/16	.07	.07	1	11.28/ea
	MT212B	10185	3/8 Mag Nut Setter	1 5/8	.05	.05	1	11.70/ea
	MT212LB	10188	3/8 Mag Nut Setter	2 9/16	.08	.08	1	13.33/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

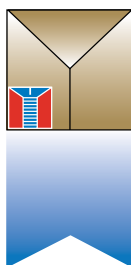

METALLICS

AMERICA'S SOURCE FOR PREMIER AND
INNOVATIVE FASTENERS & ANCHORS

TOOLS, DRILLS AND ACCESSORIES



PULL ROPE 3 STRAND POLYPROPYLENE

PART#	UPC#	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
M3161200	17175	3/16	1200'	7.80	1	104.44/ea
M14250	17235	1/4	250'	2.90	1	35.99/ea
M14600	17237	1/4	600'	6.90	1	82.26/ea
M141200	17240	1/4	1200'	13.80	1	164.48/ea
M142400	17243	1/4	2400'	27.60	1	329.00/ea
M145000	17247	1/4	5000'	57.50	1	685.44/ea
M38250	17252	3/8	250'	6.50	1	80.36/ea
M38600	17255	3/8	600'	15.60	1	183.68/ea
M381200	17258	3/8	1200'	31.20	1	367.36/ea
M382400	17262	3/8	2400'	62.40	1	734.72/ea
M12250	17267	1/2	250'	11.50	1	140.84/ea
M12600	17270	1/2	600'	27.60	1	321.87/ea
M121200	17273	1/2	1200'	55.20	1	643.72/ea

OTHER SIZES, MATERIALS AND QUANTITIES AVAILABLE BY REQUEST.



SELECT-A-BIT KIT

10 Piece Kit

KIT INCLUDES:

- 3 - Phillips Drive Bits
- 3 - Slotted Drive Bits
- 3 - Square Drive Bits
- 1 - Magnetic Holder for Power Driving.

Insert the Magnetic Holder into the star hole at the top of the bit case, and it becomes a screwdriver handle.


PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SAB10	28010	.25	1	32.56/ea kit

REPLACEMENT COMPONENTS FOR KIT

QTY. EA.	DESCRIPTION	REPLACEMENT PART #
1	Bit Holder	M10B
1	#6-8 Slotted Bit	0016B
1	#8-10 Slotted Bit	0018B
1	#10-12 Slotted Bit	00110B
1	#1 Phillips Bit	000P1B
1	#2 Phillips Bit	000P2B
1	#3 Phillips Bit	000P3B
1	#1 Square Drive Bit	000R1B
1	#2 Square Drive Bit	000R2B
1	#3 Square Drive Bit	000R3B

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

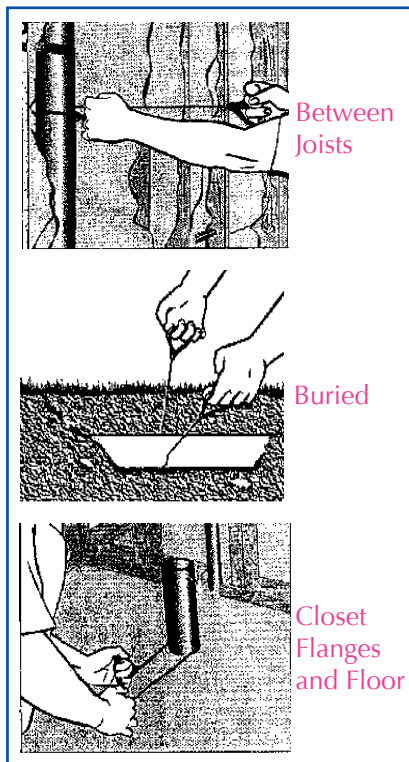


CABLE SAW

FOR PVC PLASTIC • FOR ALL PVC PIPE

DIRECTIONS:

1. Secure PVC pipe for cutting. Loop cable around pipe at the location you wish to cut.
2. Apply pressure, while making short back and forth strokes to establish a starting cut or pilot groove in the pipe.
3. Using the middle third of the cable, make longer strokes to completely cut through PVC pipe.

- A WIRE CABLE SAW WITH VINYL COVERED HANDLES.
- SUITABLE FOR CUTTING PVC PLASTIC PIPE.

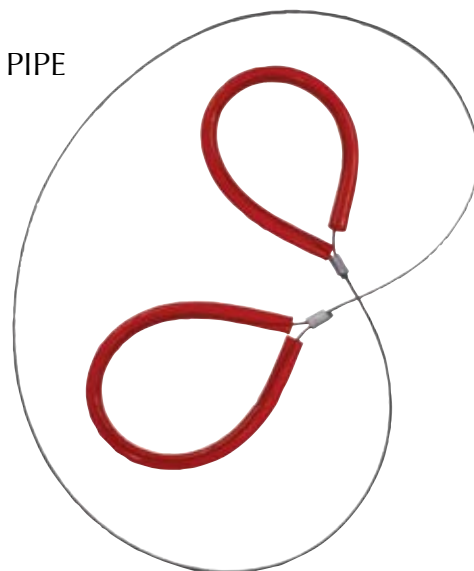

PART#	UPC#	CUTTING LENGTH	OVERALL APPROX. LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MCS26	71616	24	32	.07	1	22.80/ea

SHARPIE® PERMANENT MARKER

PERMANENT MARKERS – SMEAR-PROOF, HEAT & WATER RESISTANT

- Sharpie® fine point permanent marker, perfect for labels, plastic or corrugated. Permanent ink smear proof, heat and water resistant.



PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
KSMB1	15359	Black Magic Marker	.01	1	3.22/ea
30001	13721	Sharpie Fine Point Permanent Marker – black ink	.31	12	47.61/ea
30001-1	14583	Sharpie Black Magic Marker – Fine Point	.02	1	3.73/ea
30006	13739	Sharpie Orange Magic Marker – Fine Point	.31	12	30.66/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

SHARPIE® PERMANENT MARKERS

KING-SIZED MARKERS FOR YOUR TOUGHEST MARKING JOBS

- King Size permanent marker. Designed for the toughest marking jobs. Feature a long lasting felt chisel tip with high performance ink.
- Retractable fine tip marker. Quick drying and water resistant ink. AP certified nontoxic.



PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
M15001	13781	Sharpie King-Size Marker – black ink	.77	12	79.30/ea
M15001-1	13790	Sharpie King-Size Permanent Marker – black ink	.06	1	6.05/ea
M32701	12274	Sharpie Retractable Fine Tip Marker – black ink	.03	1	12.76/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



MARKING CRAYONS

WEATHER RESISTANT, FADE RESISTANT, LEAD FREE.

For use on lumber (rough or smooth), cardboard, concrete, metal, paper, plastic and other surfaces. Each crayon 4½" x ½".

PART#	UPC#	COLOR	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
LCB12	72600	Blue	.66	12	28.57/ea
LCBLK12	72602	Black	.66	12	28.57/ea
LCY12	72603	Yellow	.66	12	28.57/ea
LCR12	72604	Red	.66	12	28.57/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CRAYON HOLDER



- Walnut holder fits both round or hexagonal marking crayons ½" in diameter.
- Walnut handle, metal chuck, hole for wrist strap.
- Aluminum holder is spring loaded and can be used with extension handle.
- Designed to hold Lumber Crayons and High Heat Metal Crayons ½" in diameter.

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WCH1	72599	.05	1	18.44/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

AVIATION TIN SNIPS

HEAVY DUTY ALLOY STEEL



- Left cut – red handle
- Straight cut – yellow handle
- Right cut – green handle
- 10 inch length
- Serrated jaws
- Vinyl grips
- Safety latch
- Alloy steel construction

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MAVSG	37468	Aviation Snip – Right Cut (Green)	.90	1	19.32/ea
MAVSR	37469	Aviation Snip – Left Cut (Red)	.90	1	19.32/ea
MAVSY	37470	Aviation Snip – Straight Cut (Yellow)	.90	1	19.32/ea

Helpful Hints From Metallica: *Did You forget to ask?* **GOT FASTENERS?**

LAGMASTERTM *plus*

Patent Pending

Plug Into...

***The electrician's only
multipurpose tool
for hanging...***

- + WIRE
- + THREADED ROD
- + SMOOTH ROD
- + JACK CHAIN
- + SCREWS

***...with
interchangeable
heads!***

TOOLS, DRILLS AND ACCESSORIES

LAGMASTER PLUS™

The Lagmaster Plus™ is the electrician's pole tool. The unique plug-in heads make it the most efficient tool of it's kind. It increases safety by keeping your men on the floor. Use it to install ceiling wire, jack chain, threaded rod, smooth rod and overhead screw installation. Power the pole with any 3/8" or 1/2" battery operated or corded drill.



One pole...many applications!

Choose from two (2) different adjustable length models.

- MLMTA Triple 4' (18' ceilings)
- MLMT6 Triple 6' (24' ceilings)

Hang it up. (wire plug)




Lagmaster Plus™ wire plug hangs 12 or 9 Gauge wire. No need for ladders, scaffolding or scissor lifts.


Pre-wrapped wire on eye lags require a special plug (pre-wrapped plug).




Hang Wire. Move ring into the up position with set screw

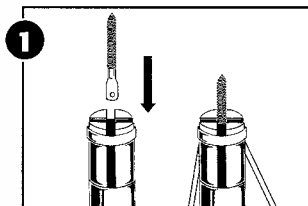


Insert the eye lag screw into secured wire plug. Insert the wire through the hole and bend the tails down.

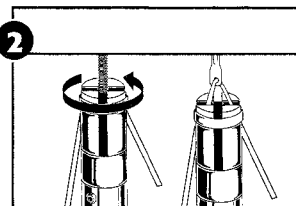


Adjust the pole to length and rotate the screw until it is seated. Pull down on the pole so that the wire is caught on the ring.

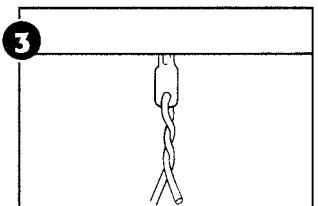


Rotate the pole again to twist the wire. Pull the wire through the plug to complete the installation.

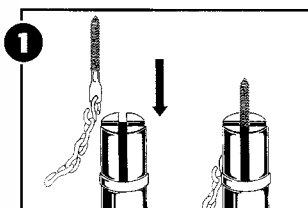

Secure a #1 1/2 "S" hook to an acoustical eye lag and to the proper size chain for your job. Insert it into the Lagmaster Plus™.

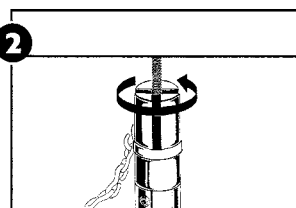

Secure the chain in the magazine so it does not whip when rotating the pole. Now rotate the eye lag screw until it is seated.

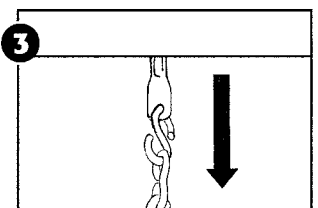

Lower the Lagmaster Plus™.

TOOLS, DRILLS AND ACCESSORIES

LAGMASTER PLUS™

DRIVE IT HOME. (socket plugs)


Install pre-cut threaded rod from the floor! Works with 3/8" or 1/4" threaded rod up to 10' long. Gets into tight spaces, vaulted ceilings, above stairwells or through ceiling grid easily.

Lagmaster Plus™ open-end socket plug-in heads work with Sammy Super Screws® and HangerMate® screws. Special twist out feature prevents over torquing and stripout even when installing from the floor.


Consult the screw manufacturer's literature for load specs and approvals on the screws.

The Lagmaster Plus™ base is the socket for HangerMate® 3/8" rod screws. The 3/8" socket plug-in works with HangerMate® 1/4" rod screws. The 5/8" socket plug-in works with Sammy Super Screws®.


Hang Threaded Rod:

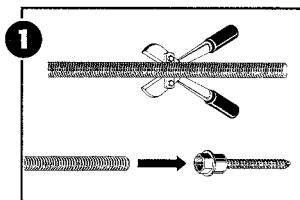


1 Cut threaded rod length and assemble to appropriate fastener.

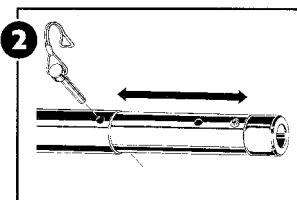

2 Adjust pole tool to length plug in the proper Lagmaster Plus™ head.

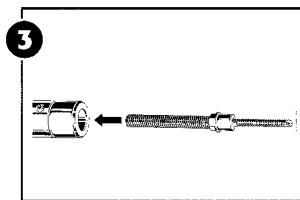

3 Load rod into Lagmaster pole tool. (The Lagmaster adjusting pin has to be 1/8" below the base or the pin may interfere with the rod.)

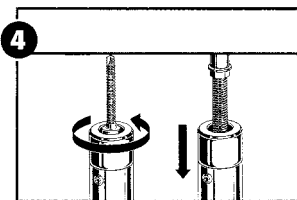

4 Install screw at proper site and pull down to remove the rod from the pole tool. The rod is now ready to receive hanger bracket.




(Patent # 5,154,104)


Turn your pole tool into a very long screwdriver. This Lagmaster Plus™ plug works with any 1/4" hex driver.

Install smooth rod with a spring clip assembly and screw. The Flash fastener is shown here.


Overhead Screw Applications: (1/4" hex plug)

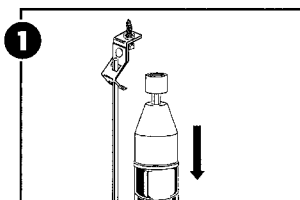

1 Plug in the Lagmaster Plus™ 1/4" hex head and insert the proper 1/4" driver. Adjust the Lagmaster pole tool to length.

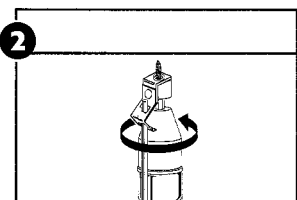

2 Push the smooth rod between the pole and the wire bale on the Lagmaster adjusting pin to keep the rod from whipping while turning in the screw for safety.

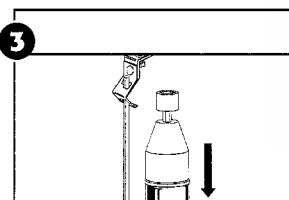

3 Turn in the screw cautiously being careful not to over torque or strip the screw. Remove the tool.



TOOLS, DRILLS AND ACCESSORIES

LAGMASTER PLUS™

One pole...many applications!



PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MLMT4	13329	Triple 4' Installation Tool 18' Ceiling	5.05	1	361.20/ea
MLMT6	13331	Triple 6' Installation Tool 24' Ceiling	6.61	1	417.20/ea

METALLICS KEYHOLE SAW WOODEN HANDLE

- Designed especially for plasterboard.
- Make cut-outs for electrical outlets, etc.
- Point sharpened for plunge cuts.



PART#	UPC#	LENGTH	BLADE EACH	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
US6	31300	6	1.5 oz	.27	11.57/ea

TOOLS, DRILLS AND ACCESSORIES



CARBON STEEL TAPS

PLUG/BOTTOMING/TAPER

	PART#	UPC#	SIZE	USE DRILL SIZE	WT. PER PKG.	STD. PKG./ MSTR. SLEEVE	SUGGESTED TRADE LIST PRICE PER
Plug	440CT	24900	4-40	#43	.05	5	25.43/ea
	632CTE	24907	6-32	#36	.01	1	5.04/ea
	632CT	24905	6-32	#36	.05	5	25.21/ea
	832CT	24910	8-32	#29	.07	5	20.83/ea
	1024CT	24915	10-24	#25	.10	5	26.65/ea
	1032CT	24920	10-32	#21	.10	5	26.65/ea
	1224CTPE	24961	12-24	11/64	.04	1	13.13/ea
	1420CT	24925	1/4-20	#7	.15	5	29.12/ea
	1428CTE	26799	1/4-28	#7	.04	1	13.83/ea
	516CT	24930	5/16-18	17/64	.16	5	31.74/ea
	3816CT	24935	3/8-16	5/16	.23	5	40.57/ea
	3824CTE	26861	3/8-24	5/16	.35	1	19.15/ea
	71620CTE	26810	7/16-20	25/64	.38	1	29.65/ea
	1213CT	24940	1/2-13	27/64	.46	5	53.08/ea
	1213CTE	24942	1/2-13	27/64	.09	1	20.62/ea
	1220CTE	26816	1/2-20	27/64	.12	1	35.17/ea
	3410CTE	26647	3/4-10	21/32	.12	1	78.23/ea
Bottoming	440CTBE	24899	4-40	#43	.02	1	13.33/ea
	632CTB	24906	6-32	#36	.02	5	29.26/ea
	1024CTBE	24914	10-24	#25	.03	1	11.37/ea
	1032CTBE	24923	10-32	#21	.03	1	11.24/ea
	1420CTBE	24927	1/4-20	#7	.04	1	12.99/ea
	1428CTBE	26803	1/4-28	#7	.04	1	10.25/ea
	51618CTBE	26608	5/16-18	17/64	.05	1	15.32/ea
	3816CTBE	26619	3/8-16	5/16	.08	1	14.17/ea
	1213CTBE	26630	1/2-13	27/64	.10	1	17.53/ea
Taper	440CTTE	26590	4-40	#43	.02	1	13.33/ea
	632CTTE	26597	6-32	#36	.02	1	10.81/ea
	1024CTTE	24918	10-24	#25	.03	1	11.24/ea
	1032CTTE	24924	10-32	#21	.03	1	11.24/ea
	1420CTTE	24928	1/4-20	#7	.04	1	12.99/ea
	51618CTTE	26614	5/16-18	17/64	.05	1	15.32/ea
	3816CTTE	26621	3/8-16	5/16	.08	1	14.17/ea
	1213CTTE	26629	1/2-13	27/64	.10	1	28.36/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST.



TAP WRENCH T-HANDLE STYLE

PART#	UPC#	CAPACITY	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TWH1	24970	0 to 1/4	.15	1	17.71/ea
TWH2	24975	1/4 to 1/2	.39	1	29.27/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



CONCRETE SCREW INSTALLATION KIT

8 PIECE KIT


KIT INCLUDES:

- | | |
|-------------------|-------------------------|
| 1 - Drill Driver | 1 - Phillips Bit Holder |
| 1 - Drill Adapter | 2 - Phillips Bits |
| 2 - Hex Drivers | 1 - Allen Hex Key |

Drill Bit Not Included

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
KIT					
IT1000	31200	Installation Tool (complete kit)	.95	1	61.50/ea kit
REPLACEMENT COMPONENTS FOR KIT					
MHD14	31205	1/4 Magnetic Hex Driver	.04	1	34.22/ea
MHD56	31210	5/16 Magnetic Hex Driver	.05	1	34.22/ea
PBH	31215	#2 & #3 Phillips Bit Holder	.01	1	42.15/ea
ITSLEVE	31203	Drill/Driver Adapter	.28	1	50.14/ea
PB2	31220	#2 Phillips Bit	.01	1	1.92/ea
PB3	31225	#3 Phillips Bit	.01	1	1.92/ea
HK1	31230	1/8 Allen Hex Key	.01	1	1.66/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

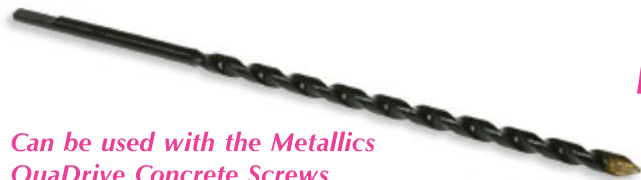

*Can be used with the Metallics
QuaDrive Concrete Screws*

MASONRY DRILLS FOR CONCRETE SCREWS

PART#	UPC#	SIZE	SCREW DIA.	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
CD1	31250	5/32 x 3 1/2	3/16	.02	1	4.12/ea
CD2	31255	5/32 x 4 1/2	3/16	.02	1	4.86/ea
CD3	31260	5/32 x 5 1/2	3/16	.02	1	5.53/ea
CD5	31265	3/16 x 3 1/2	1/4	.02	1	4.21/ea
CD6	31270	3/16 x 4 1/2	1/4	.02	1	4.98/ea
CD7	31275	3/16 x 5 1/2	1/4	.03	1	7.06/ea
CD8	31280	3/16 x 6 3/4	1/4	.05	1	9.07/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



10 oz

32 oz

CAULK GUNS

PISTON ROD WITH DOUBLE FRICTION
PLATE QUICK-RELEASE LEVER



CG77 Has
Ratchet Rod

CG101 Has
Smooth Rod

PART#	UPC#	TYPE	TUBE SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
CG1	35020	Smooth Rod	10 oz	.89	1	8.46/ea
CG101	35065	Smooth Rod	10 oz	4.35	1	7.42/ea
CG2	35021	Smooth Rod	32 oz	2.03	1	17.13/ea
CG32	35050	Smooth Rod	32 oz	1.92	1	39.46/ea
CG77	35060	Ratchet Rod	10 oz	.98	1	14.22/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



GOLD HIGH-SPEED DRILL KITS

GOLD SURFACE TREATED HEAVY DUTY DRILLS

13 piece kit In Metal Index Case

13 Drills: $\frac{1}{16}$ thru $\frac{1}{4}$ x $\frac{1}{64}$



135° SPLIT
POINT



THREE FLATS
ON SHANK

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
GDK13	24502	.67	1	45.33/ea kit



HEX SHANK DRILL SET

5 PIECE SET

5 Drills: $\frac{3}{32}$, $\frac{7}{64}$, $\frac{1}{8}$, $\frac{9}{64}$, $\frac{5}{32}$

118° POINT

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
DHS5	24530	.15	Set of 5 drills	31.91/ea



TAP AND DRILL BIT SETS

13 OR 19 PIECE 6-32 — $\frac{1}{2}$ -13

- 6 Carbon Plug Taps - 4-40, 6-32, 8-32, 10-24, 10-32, $\frac{1}{4}$ -20
- 6 HSS Twist Drills - #43, #36, #29, #25, #21, #7
- 1 T-Handle Wrench

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TDS13	24945	.44	1	64.66/ea
TDS19	24951	.67	1	145.00/ea



SCREW EXTRACTOR AND DRILL BIT SET

10 PIECE

- Screw Extractors - #1, #2, #3, #4, #5
- Twist Drills - $\frac{5}{64}$, $\frac{7}{64}$, $\frac{5}{32}$, $\frac{1}{4}$, $\frac{17}{64}$

118° POINT

PART#	UPC#	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SEDS10	25028	.47	1	53.19/ea

TOOLS, DRILLS AND ACCESSORIES



COMBINATION HIGH SPEED STEEL DRILL-TAP

PART#	UPC#	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
DT632	24094	6-32	.02	1	38.61/ea
DT832	24095	8-32	.02	1	39.52/ea
DT1024	24122	10-24	.02	1	40.96/ea
DT1032	24096	10-32	.02	1	40.96/ea
DT1420	24097	1/4-20	.03	1	47.82/ea
DT3816	24098	3/8-16	.08	1	66.86/ea
DT1213	24099	1/2-13	.13	1	93.84/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST



SHIP AUGER BITS

HEX SHANK

- Single twist with single cutter and side up
- Machine ground hollows, deep throat for fast chip removal
- 7/16 shank for 3 jaw chucks
- Heat treated tool steel for strength and long life

PART#	UPC#	BORE DIAMETER	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
AS916	24600	9/16	8	.25	1	33.97/ea
AS588	31348	5/8	8	.30	1	31.02/ea
AS11168	24602	11/16	8	.31	1	46.06/ea
AS34	24603	3/4	8	.43	1	55.03/ea
AS1316	24604	13/16	8	.42	1	55.15/ea
AS78	24605	7/8	8	.54	1	64.76/ea
AS1516	24606	15/16	8	.40	1	65.98/ea
AS1	24607	1	8	.55	1	70.04/ea
AS118	24608	1 1/8	8	.79	1	78.56/ea
AS114	24609	1 1/4	8	.55	1	90.55/ea
AS138	24610	1 3/8	8	.82	1	117.78/ea
AS112	24611	1 1/2	8	1.22	1	126.24/ea
AL916	24615	9/16	18	.65	1	65.30/ea
AL58	24616	5/8	18	.72	1	71.96/ea
AL1116	24617	11/16	18	.87	1	81.29/ea
AL34	24618	3/4	18	.71	1	82.66/ea
AL1316	24619	13/16	18	1.08	1	82.66/ea
AL78	24620	7/8	18	1.24	1	85.15/ea
AL1516	24621	15/16	18	1.36	1	79.18/ea
AL1	24622	1	18	1.54	1	82.52/ea
AL118	24623	1 1/8	18	1.42	1	118.38/ea
AL114	24624	1 1/4	18	2.35	1	126.56/ea
AL138	24625	1 3/8	18	2.94	1	141.94/ea
AL112	24626	1 1/2	18	3.30	1	149.74/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST



SINGLE SPUR DOUBLE TWIST DRILLS

PART#	UPC#	DIAMETER	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
ED78	24854	7/8	8 1/2	.48	1	65.13/ea
ED1	24855	1	8 1/2	.51	1	68.24/ea
ED114	24857	1 1/4	8 1/2	.79	1	95.59/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

QUIK-BIT FLAT WOOD BORING BITS




PACKED IN VINYL POUCH

E-Z to display packaging

PART#	UPC#	SIZE	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
QB1	24701	1/4	6	.05	1	8.34/ea
QB2	24702	5/16	6	.06	1	7.87/ea
QB3	24703	3/8	6	.09	1	8.47/ea
QB4	24704	7/16	6	.06	1	8.47/ea
QB5	24705	1/2	6	.09	1	8.47/ea
QB6	24706	9/16	6	.09	1	8.87/ea
QB7	24707	5/8	6	.09	1	8.87/ea
QB8	24708	11/16	6	.09	1	9.18/ea
QB9	24709	3/4	6	.09	1	9.18/ea
QB10	24710	13/16	6	.10	1	9.32/ea
QB11	24711	7/8	6	.10	1	9.69/ea
QB12	24712	15/16	6	.11	1	10.38/ea
QB13	24713	1	6	.13	1	10.38/ea
QB14	24714	1 1/8	6	.13	1	14.24/ea
QB15	24715	1 1/4	6	.13	1	14.24/ea
QB16	24716	1 3/8	6	.14	1	14.39/ea
QB17	24717	1 1/2	6	.14	1	14.39/ea
QB20	24720	1/4	16	.18	1	21.08/ea
QB22	24722	3/8	16	.27	1	25.72/ea
QB24	24724	1/2	16	.33	1	26.25/ea
QB26	24726	5/8	16	.28	1	28.63/ea
QB27	24727	11/16	16	.30	1	22.00/ea
QB28	24728	3/4	16	.28	1	31.55/ea
QB29	24729	7/8	16	.32	1	31.55/ea
QB31	24731	1	16	.30	1	30.77/ea
QB34	24734	1 3/8	16	.55	1	26.66/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

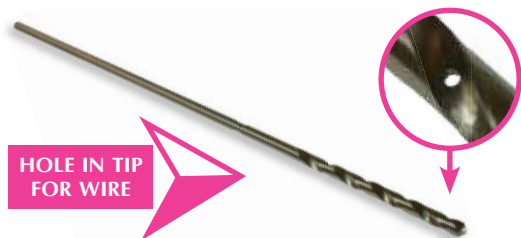

BELL HANGER DRILLS

- Specifically designed for wood product construction
- For all telephone, electrical, small wire, protective alarm and cable T.V. uses
- Resists damage during drilling if metal is encountered
- Not for masonry products

PART#	UPC#	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BHD14	26057	1/8	12	1/8	.05	1	21.37/ea
BHD1	26000	1/4	12	1/4	.16	1	21.76/ea
BHD2	26005	5/16	12	5/16	.16	1	24.22/ea
BHD3	26010	3/8	12	3/8	.17	1	26.15/ea
BHD4	26015	1/2	12	1/2	.18	1	33.88/ea
BHD15	26058	3/16	18	3/16	.18	1	34.58/ea
BHD5	26020	1/4	18	1/4	.26	1	40.32/ea
BHD6	26025	5/16	18	5/16	.40	1	44.78/ea
BHD7	26030	3/8	18	3/8	.56	1	48.28/ea
BHD8	26035	1/2	18	3/8	.90	1	55.09/ea
BHD9	26040	1/4	24	1/4	.35	1	56.62/ea
BHD10	26045	5/16	24	5/16	.69	1	61.53/ea
BHD11	26050	3/8	24	3/8	.70	1	63.94/ea
BHD12	26055	1/2	24	1/2	.75	1	70.59/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

TOOLS, DRILLS AND ACCESSORIES



SDS-PLUS HAMMER DRILLS

PART#	UPC#	DIAMETER	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SDS53265	24565	$\frac{5}{32}$	6 $\frac{1}{4}$	.10	1	11.25/ea
SDS31645	24101	$\frac{3}{16}$	4 $\frac{1}{2}$	.08	1	19.99/ea
SDS31665	24102	$\frac{3}{16}$	6 $\frac{1}{2}$	.10	1	20.38/ea
SDS3168	24103	$\frac{3}{16}$	8 $\frac{1}{4}$	.10	1	28.72/ea
SDS73265	24297	$\frac{7}{32}$	6 $\frac{1}{4}$	.08	1	11.25/ea
SDS1445	24104	$\frac{1}{4}$	4 $\frac{1}{2}$	.09	1	19.99/ea
SDSB1445	24326	$\frac{1}{4}$	4 $\frac{1}{2}$	2.25	25	435.76/ea pkg
SDS1465	24106	$\frac{1}{4}$	6 $\frac{1}{4}$	.11	1	20.38/ea
SDSB1465	24331	$\frac{1}{4}$	6 $\frac{1}{2}$	2.15	25	444.72/ea pkg
SDS149	24107	$\frac{1}{4}$	8 $\frac{1}{4}$	.14	1	28.72/ea
SDS1412	24301	$\frac{1}{4}$	14	.16	1	36.75/ea
SDS1420	24304	$\frac{1}{4}$	20	.22	1	45.75/ea
SDS3865	24108	$\frac{3}{8}$	6 $\frac{1}{4}$	.16	1	26.82/ea
SDS388	24117	$\frac{3}{8}$	8 $\frac{1}{4}$	.20	1	38.00/ea
SDS389	24109	$\frac{3}{8}$	9	.20	1	51.67/ea
SDS3812	24306	$\frac{3}{8}$	12 $\frac{1}{4}$	.27	1	31.75/ea
SDS1265	24111	$\frac{1}{2}$	6 $\frac{1}{2}$	.22	1	36.59/ea
SDSB1265	24336	$\frac{1}{2}$	6 $\frac{1}{4}$	5.60	25	755.72/ea pkg
SDS129	24112	$\frac{1}{2}$	10 $\frac{1}{4}$	.34	1	29.26/ea
SDS1212	24311	$\frac{1}{2}$	12 $\frac{1}{4}$	.40	1	32.13/ea
SDS1218	24312	$\frac{1}{2}$	18	.67	1	37.88/ea
SDS1224	24313	$\frac{1}{2}$	24	.73	1	69.46/ea
SDS9166	24575	$\frac{9}{16}$	6 $\frac{1}{4}$	.24	1	25.63/ea
SDS5865	24113	$\frac{5}{8}$	6 $\frac{1}{2}$	.26	1	48.68/ea
SDS589	24114	$\frac{5}{8}$	8	.31	1	59.11/ea
SDS111610	24585	$\frac{11}{16}$	12	.45	1	56.50/ea
SDS348	24316	$\frac{3}{4}$	8	.44	1	38.00/ea
SDS788	24321	$\frac{7}{8}$	8	.76	1	65.50/ea
SDS18	21218	1	8	.87	1	73.75/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST




POWER BIT EXTENSIONS

- Hex wrench included
- Two set screws

PART#	UPC#	DIAMETER	LENGTH	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BE1418	24875	$\frac{1}{4}$	18	.48	1	53.77/ea
BE5618	24880	$\frac{5}{16}$	18	1.50	1	50.33/ea
BE7612	24885	$\frac{7}{16}$	12	.86	1	52.83/ea
BE7618	24890	$\frac{7}{16}$	18	1.20	1	61.00/ea
BE7624	24891	$\frac{7}{16}$	24	1.56	1	75.05/ea

 OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



AMERICA'S SOURCE FOR PREMIER AND INNOVATIVE
FASTENERS & ANCHORS

TOOLS, DRILLS AND ACCESSORIES

MULTI STEP DRILLS

SELF STARTING TIP ELIMINATES NEED FOR
PILOT HOLE DRILLING

SD34

SD12

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD12	24080	1/8-1/2 2 FLUTE, 13 STEP	.06	1	61.71/ea
SD34	24082	1/4-3/4 2 FLUTE, 9 STEP	.10	1	89.60/ea
SD78	24084	7/8-1 1/8 3 STEP	.16	1	137.85/ea

3 SET COMBO PACK

SDCP3	24088	1/8-1/2 2 FLUTE, 13 STEP	.37	1	289.32/ea
		1/4-3/4 2 FLUTE, 9 STEP			
		7/8-1 1/8 3 STEP			

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

SAWTOOTH MULTISPUR WOOD DRILL BITS

Packaged individually
with extra double end
screws and wrench

PART#	UPC#	SIZE	FITS
REPLACEMENT SCREW POINTS			
SP0001	23550	1/4	1 1/4 - 2 9/16
SP0002	23552	1/4	3 - 4 5/16

PART#	UPC#	DESCRIPTION	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
306MS0	23500	1 3/8 for 3/4 pipes	7/16	.43	1	72.11/ea
306MS1	23505	1 1/2 for 1 pipes	7/16	.46	1	72.11/ea
306MS2	23510	1 3/4 for 1 1/4 pipes	7/16	.51	1	74.18/ea
306MS3	23515	2 1/8 for 1 1/2 pipes	7/16	.74	1	74.18/ea
306MS4	23520	2 9/16 for 2 pipes	7/16	.89	1	112.37/ea

EXTENSIONS FOR SHIP AUGERS & MULTISPUR

HEX WRENCH INCLUDED • TWO SET SCREWS • PACKAGED IN VINYL POUCH

BE7612	24885	7/16 X 12	7/16	.86	1	52.83/ea
BE7618	24890	7/16 X 18	7/16	1.20	1	61.01/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

BULK PACKAGED CARBIDE MASONRY DRILLS

We know
the drill.

You need it,
we have it!

PART#	UPC#	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BFRB11	37049	3/16	4	9/64	2.06	100	300.77/ea pkg
BFRB22	37066	3/16	6	9/64	2.50	50	142.80/ea pkg
BFRB12	37050	1/4	4	1/4	3.43	100	345.89/ea pkg
BFRB13	37054	1/4	6	1/4	3.53	50	219.91/ea pkg
BFRB13100	37040	1/4	6	1/4	7.06	100	294.00/ea pkg
BFRB14	37055	5/16	4	1/4	3.08	75	327.51/ea pkg
BFRB16	37060	3/8	4	1/4	3.14	50	141.61/ea pkg
BFRB38100	37046	3/8	6	1/4	11.00	100	898.80/ea pkg
BFRB21	37065	1/2	4	1/4	2.64	25	50.81/ea pkg
BFRB20	37070	1/2	6	3/8	4.73	25	59.44/ea pkg

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

FLEXIBLE FISH-BITS



- Unique flexible self-feeding bits up to 72" long suitable for drilling holes with the length of wall cavities and through hidden studs with no damage to wallboard plaster or any exterior finish.
- Bit has hole at tip and the shank which allows you to fish wire

PART#	UPC#	DESCRIPTION	SIZE	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFB1454	26455	FISH-BIT	1/4 x 54	3/16	.65	1	72.02/ea
MFB3854	26459	FISH-BIT	3/8 x 54	3/16	.65	1	75.71/ea
MFB1254	26451	FISH-BIT	1/2 x 54	3/16	.65	1	79.18/ea
MFB1472	26457	FISH-BIT	1/4 x 72	3/16	.75	1	76.36/ea
MFB3872	26461	FISH-BIT	3/8 x 72	3/16	.75	1	77.31/ea
MFB1272	26453	FISH-BIT	1/2 x 72	3/16	.65	1	79.86/ea
MSG1	26445	Steering Guide			.47	1	67.07/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



CARBIDE MASONRY DRILLS

BLACK

- Specially designed spirals for fast dust removal
- E-Z TO DISPLAY PACKAGING
- Slow spiral drills can be used with either rotary or hammer drills in hard brick, sandstone, bluestone, terracotta block and hard concrete

PART#	UPC#	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SLOW SPIRAL							
BFR10	24100	1/8	3	3/32	.02	1	3.83/ea
BFR2	24090	3/16	4	1/8	.02	1	3.95/ea
BFR11	24105	3/16	4	9/64	.03	1	3.83/ea
BFR22	24151	3/16	6	9/64	.04	1	4.87/ea
BFR12	24110	1/4	4	1/4	.04	1	3.83/ea
BFR13	24115	1/4	6	1/4	.06	1	5.60/ea
BFR14	24120	5/16	4	1/4	.05	1	4.83/ea
BFR15	24125	5/16	6	1/4	.08	1	6.96/ea
BFR16	24130	3/8	4	1/4	.07	1	6.28/ea
BFR17	24135	3/8	6	1/4	.11	1	7.80/ea
BFR18	24140	7/16	6	1/4	.15	1	7.92/ea
BFR21	24145	1/2	4	1/4	.11	1	9.02/ea
BFR19	24150	1/2	6	1/4	.20	1	10.60/ea
BFR20	24155	1/2	6	3/8	.20	1	10.60/ea
FAST SPIRAL							
BFRS12	37161	1/4	4	1/4	.04	1	2.22/ea
BFRS125	37226	1/4	4	1/4	.20	5	11.07/ea
BFRS14	37163	5/16	4	1/4	.05	1	2.39/ea
BFRS145	37246	5/16	4	1/4	.25	5	11.91/ea
BFRS16	37165	3/8	4	1/4	.07	1	2.58/ea
BFRS165	37266	3/8	4	1/4	.35	5	12.88/ea
BFRS21	37170	1/2	4	1/4	.09	1	3.00/ea
BFRS215	37291	1/2	4	1/4	.45	5	14.98/ea
GLASS AND CERAMIC							
GL14	26914	1/4	3	1/4	.04	1	25.34/ea
MULTIPURPOSE							
MPD1	37491	1/8	3	3/32	.01	1	5.60/ea
CONSTRUCTION MASONRY							
MPD3	37493	3/16	3 1/2	1/8	.03	1	8.75/ea
TITANIUM							
HSD10T	27210	7/32	3 3/4	1/8	.04	1	14.48/ea
HSD29T	27229	13/64	3 3/4	1/8	.03	1	13.83/ea

OTHER QUANTITIES AVAILABLE UPON REQUEST


TOOLS, DRILLS AND ACCESSORIES

EXTRA LONG MASONRY DRILLS



PART#	UPC#	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BTT1	24185	1/4	12	1/4	.15	1	13.76/ea
BTT9	24225	1/4	18	1/4	.22	1	23.90/ea
BTT2	24190	5/16	12	1/4	.22	1	13.96/ea
BTT10	24230	5/16	18	1/4	.34	1	37.83/ea
BTT3	24195	3/8	6	3/8	.29	1	16.13/ea
BTT11	24235	3/8	18	3/8	.45	1	26.25/ea
BTT4	24200	1/2	12	3/8	.44	1	19.39/ea
BTT12	24240	1/2	18	3/8	.64	1	30.74/ea
BTT22	24160	9/16	6	3/8	.31	1	19.29/ea
BTT23	24165	5/8	6	3/8	.31	1	26.98/ea
BTT5	24205	5/8	12	3/8	.62	1	25.67/ea
BTT13	24245	5/8	18	1/2	.94	1	36.50/ea
BTT24	24170	3/4	6	1/2	.47	1	24.75/ea
BTT6	24210	3/4	12	1/2	.91	1	40.57/ea
BTT14	24250	3/4	18	1/2	1.37	1	44.62/ea
BTT25	24175	7/8	6	1/2	.58	1	27.44/ea
BTT7	24215	7/8	12	1/2	1.24	1	42.58/ea
BTT15	24255	7/8	18	1/2	1.79	1	87.17/ea
BTT26	24180	1	6	1/2	.75	1	36.02/ea
BTT8	24220	1	12	1/2	1.53	1	57.78/ea
BTT16	24260	1	18	1/2	2.50	1	87.38/ea


OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

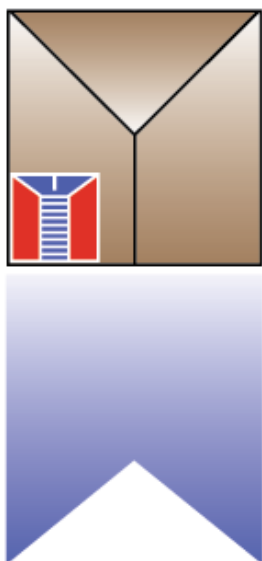

Metallics

An **AMERICAN** Source For Premier
and Innovative Fasteners and Anchors

*We believe Metallics has the largest ratio of
American made to foreign produced product
of any other American fastener company.*

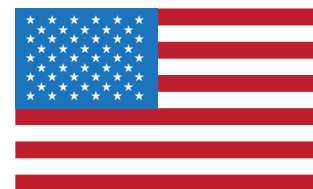

**SERVING THE ELECTRICAL, PLUMBING, HEATING AND AIR CONDITIONING
DISTRIBUTOR MARKETPLACE**

TOOLS, DRILLS AND ACCESSORIES



(Roof Jack Only)

MASTER FLASH®

COMPLETE ROOF JACK KIT

Everything in ONE KIT!

- The Master Flash® Roof Jack
- UV Cable Tie
- Metallics Special Sealant
- 10 x 1 Indented Hex Self-Drilling Screws
- Easy Installation Instructions

Universal Pipe Flashing System...

- Weather Resistant
- Adapts to Many Roof Surfaces
- Easily Installed
- Uniform Plumbing Code (UPC®) Listed

Numerous Applications...

- Plumbing, Heating/Air Conditioning Equipment
- Electrical Service Entrances
- TV Aerials
- Masts, Vents or Pipes Through Decks or Bulkheads

PART#	UPC#	FITS PIPE SIZES/ JACK BASE SIZE	DESCRIPTION OF CONTENTS	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RJK1	31400	1/4 - 2 / 4 1/2 Base	1 - Roof Jack, 1 - 25 Sealant Strip, 12 - Drive Screws, 1 - 11 Cable Tie	.51	1	36.72/ea
RJK2	31401	1/4 - 3 / 6 Base	1 - Roof Jack, 1 - 35 Sealant Strip, 16 - Drive Screws, 1 - 15 Cable Tie	.77	1	42.66/ea
RJK3	31402	1/4 - 4 / 8 Base	1 - Roof Jack, 1 - 45 Sealant Strip, 20 - Drive Screws, 1 - 21 Cable Tie	1.13	1	50.18/ea
RJK4	31397	4 x 8 1/4 / 11 Base	1 - Roof Jack, 1 - 55 Sealant Strip, 24 - Drive Screws, 1 - 21 Cable Tie	1.79	1	127.46/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MASTER FLASH ROOF JACKS – BULK/UNPACKAGED

PART#	UPC#	FITS PIPE SIZES/ JACK BASE SIZE	DESCRIPTION OF CONTENTS	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RJK1B	31237	1/4 - 2 / 4 1/2 Base	1 - Roof Jack	.27	1	22.56/ea
RJK2B	31238	1/4 - 3 / 6 Base	1 - Roof Jack	1.01	1	26.01/ea
RJK3B	31239	1/4 - 4 / 8 Base	1 - Roof Jack	2.10	1	30.58/ea

OTHER SIZES AND QUANTITIES AVAILABLE UPON REQUEST

MASTER FLASH® IS A REGISTERED TRADEMARK

DAP® DOW CORNING® SILICONE SEALANT

Protect and seal with 100% silicone rubber. Waterproof and flexible. Non-paintable.
50 year manufacturer durability guarantee. Meets ASTM C-920, Class 25, Type S, Grade NS.

PART#	UPC#	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WDSC10	71234	CLEAR - 10.1 oz.	.74	1	16.11/ea
WDSW10	71235	WHITE - 10.1 oz.	.78	1	16.45/ea


OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

DAP® DOW CORNING® ARE A REGISTERED TRADEMARK

GREY BUTYL TAPE FOR CAULKING

PART#	UPC#	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TC1	31236	1/8" thick x 3/4" wide x 30' long.	1.08	1	31.20/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

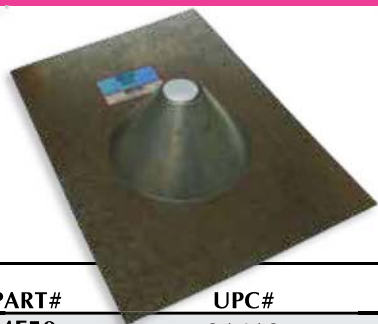

ROOF JACKS


26 GAUGE
Two-piece galvanized

PART#	UPC#	PIPE SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MF50	31410	1/2	1.00	1	10.40/ea
MF75	31411	3/4	.98	1	10.40/ea
MF100	31412	1	.98	1	10.40/ea
MF125	31413	1 1/4	.97	1	10.40/ea
MF150	31414	1 1/2	.96	1	10.40/ea
MF200	31415	2	1.12	1	10.40/ea

For 0/12 - 5/12 roof pitch

Size may vary depending on vendor. Please check with Metallics for proper dimensions.

[OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST](#)

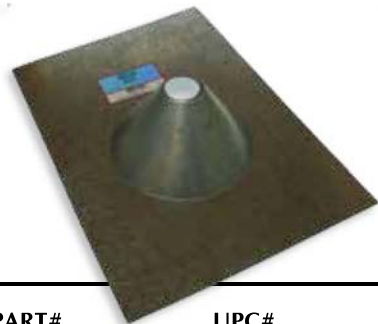

ROOF JACKS


26 GAUGE
Two-piece galvanized

PART#	UPC#	PIPE SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFHA50	31416	1/2	1.80	1	12.91/ea
MFHA75	31417	3/4	1.75	1	12.91/ea
MFHA100	31418	1	1.00	1	12.91/ea
MFHA125	31419	1 1/4	1.50	1	12.91/ea
MFHA150	31420	1 1/2	2.00	1	12.91/ea
MFHA200	31421	2	1.74	1	12.91/ea

For 0/12 - 5/12 roof pitch

Size may vary depending on vendor. Please check with Metallics for proper dimensions.

[OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST](#)

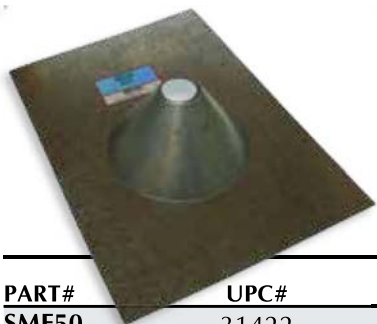

ROOF JACKS

26 GAUGE
One-Piece Spun Galvanized

PART#	UPC#	PIPE SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SMF50	31422	1/2	1.20	1	10.90/ea
SMF75	31423	3/4	1.53	1	10.90/ea
SMF100	31424	1	.76	1	10.90/ea
SMF125	31425	1 1/4	1.48	1	10.90/ea
SMF150	31426	1 1/2	.75	1	10.90/ea
SMF200	31427	2	1.50	1	10.90/ea

For 0/12 - 5/12 roof pitch

Size may vary depending on vendor. Please check with Metallics for proper dimensions.

[OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST](#)

TOOLS, DRILLS AND ACCESSORIES



12"

3-in-1 ROOF FLASHINGS

GALVANIZED BASE ROOF FLASHINGS

24 Gauge with Elastomer Collar

8"

Stock No. MRJ50

Fits pipe sizes: 1/2, 3/4, 1

Fits base size: 8 3/4 x 12 1/2

- Slides over pipe - for pitch to 45 degree.
- Rustproof, stamped galvanized 24 gauge.
- 18 x 18 base for code required areas.
- Rated 180°F continuous heat.
- Approved for Type B installations.



12"

10"

Stock No. MRJ125

Fits pipe sizes: 1 1/2, 2, 3

Fits base size: 10 3/4 x 12 1/2

- Slides over pipe. Type of base determines pitch.
- Ring on collar tears off, allowing flashings to seal different pipe diameters.
- Non-fading, cracking and rusting bases and sealing collars.
- Rated 180°F continuous heat.
- Approved for Type B installations.

PART#	UPC#	PIPE SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MRJ50	31408	1/2 - 1	.82	1	16.49/ea
MRJ125	31409	1 1/4 - 3	1.16	1	28.71/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



FLOOR FLANGE

GALVANIZED

PART#	UPC#	PIPE SIZE	ANCHOR HOLE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFF25	16201	1/2	1/4	.27	1	7.35/ea
MFF75	16202	3/4	1/4	.49	1	8.69/ea
MFF100	16203	1	1/4	.65	1	11.14/ea
MFF125	16204	1 1/4	1/4	.88	1	15.20/ea
MFF150	16205	1 1/2	1/4	1.16	1	16.11/ea
MFF200	16206	2	5/16	1.55	1	21.38/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



RUBBER TARP STRAPS

PART#	UPC#	STRAP LENGTH MINUS HOOKS	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
RTS14	12060	10	.19	2.98/ea
RTS19	12062	15	.24	3.62/ea
RTS24	12064	21	.25	4.58/ea
RTS35	12066	31	.33	3.74/ea
RTS45	12068	41	.40	7.89/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



MASTERLOCK®

FULLY ADJUSTABLE 5/16 X 6' LOCKING VINYL COATED BRAIDED STEEL CABLE



Black Design



Camo Design



Increased Security:

Cable length adjust to any position from 6' to 6'.

Application Flexibility:

Threads through places other cables cannot.

Cut Resistant:

5/16" (8mm) braided steel cable.

Scratch Resistant:

Vinyl coated cable and ABS plastic lock body.

Pick Resistant:

Reliable pin tumble mechanism.

Don't Just Tie It Down, Lock It Down!

PART#	UPC#	U/M	SUGGESTED TRADE LIST PRICE PER
PYL01BLK	13080	1	30.52/ea
PYL01CAM	13085	1	34.91/ea



BRAIDED STEEL LOOPED CABLE

PART#	UPC#	DIAMETER	LENGTH	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
TBC4	31454	3/8	4	.84	21.30/ea
TBC15	31465	3/8	15	2.40	49.40/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MASTERLOCK® SET



PART#	UPC#	SHACKLE KEYED ALIKE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
PDL1	31481	1	1.60	2	56.16/ea
PDL2	31482	2 1/2	1.90	3	64.05/ea



An American Made Alternative To the Blue Concrete Screw – See Page 138.



QUADRIVE CONCRETE SCREW ANCHORS

Large fillet under head to fit 3/16" and 1/4" holes provides greater driving strength

Fluted, interrupted threads aid tapping into masonry products

Hilo threads for faster application

Silver color to match conduit, strap and concrete

STOP THE SNAPPING



Made by
Avanti Screw, Inc.,
A Metallics Affiliate

We will be glad to send a sample bag of 10 pieces to our Distributors for their customer trials. **Please specify size!**

Metallics Inc. • 800-243-8272 • sales@metallics.us

www.metallics.us