

**NEW**



# C-Lite™ Product Catalog

Cree Canada

June 2018

**C-LITE™**  
LED LIGHTING BY CREE



## EFFICIENCY YOU NEED. QUALITY YOU TRUST.

C-Lite™ LED Lighting by Cree offers a broad range of reliable, easy to install LED lighting products with all the options you need and backed by Cree.

### SIMPLE

Our mission is simple: provide high performance, go-to LED lighting at incredible value. Contractors have enough to worry about—C-Lite™ products make lighting projects one less hurdle in a day full of them.

### EASY

From easy installation to making sure our products are always in stock, easy to find and ready to work, we make jobs of all sizes quick, easy and painless. C-Lite™ LED Lighting by Cree is your no hassle, “hey, that was easy” choice.

### QUALITY

Cree won’t put their name on just any box. Engineered to deliver great energy savings and powerful performance, C-Lite™ LED Lighting by Cree is backed by a great warranty and Cree’s world-class live customer support. You can relax knowing that with this, Cree has got your back.



## C-LITE™ STOCK & FLOW PRODUCTS

### C-LITE™ - LED OUTDOOR

LED Area Lights, 120-277V.....	3
Shoebox LED Area, Lights 120-277V .....	4
LED Area Light Accessories, 120-277V.....	5
LED Canopy, 120-277V .....	6
Compact LED Floodlights, 120-277V.....	7
High Performance LED Floodlights & Accessories, 120-277V .....	8
LED Wall Mounts, 120V .....	9
Slimline LED Wall Packs, 120-277V.....	10
Slimline LED Wall Pack Accessories, 120-277V.....	11
LED Wall Packs, 120-277V.....	12
LED Wall Pack Accessories, 120-277V .....	13
LED Vapor Tights, 120V.....	14

### C-LITE™ - LED INDOOR

LED Flat Panel Troffers, 120-277V .....	15
LED Round High Bays & Low Bays, 120-277V.....	16
LED Linear High Bays, 120-277V.....	17
LED High & Low Bay Accessories, 120-277V.....	18
General LED Accessories, 120-277V.....	19

## LED AREA LIGHTS, 120-277V

### Stylish Modern Design, Type III Optimized Distribution



C-AR-A-2LD



C-AR-A-4LD

- Category: LED Outdoor Area Light
- CRI: >70
- Location Type: Wet
- Voltage: 120-277V
- High LPW: up to 103
- Watts: 117 to 228
- Non-Dimmable

Item	SKU	Replaces	CCT	Lumens	Finish Colour
<b>C-LITE™ Type III LED Area - 12,000 Lumens</b>					
LED Area Light	C-AR-A-2LD-12L-40K-DB°	250W PSMH	4000K	12,400	Dark Bronze
LED Area Light	C-AR-A-2LD-12L-50K-DB°	250W PSMH	5000K	12,200	Dark Bronze
<b>C-LITE™ Type III LED Area - 23,000 Lumens</b>					
LED Area Light	C-AR-A-4LD-23L-40K-DB°	400W PSMH	4000K	23,100	Dark Bronze
LED Area Light	C-AR-A-4LD-23L-50K-DB°	400W PSMH	5000K	22,800	Dark Bronze

## DUSK TO DAWN LED AREA LIGHTS, 120-277V

### Versatility with a Lower Lumen Option



LED Dusk to Dawn (3L)

- Category: LED Outdoor Area Light
- CRI: >70
- Location Type: Wet
- Voltage: 120-277V
- Watts: 23
- Non-Dimmable
- Finish Color: Gray

Item	SKU	Replaces	CCT	Lumens	Size
<b>C-LITE™ Dusk to Dawn LED Area Light</b>					
LED Area Light	C-AR-A-DD-3L-50K-GR	70W MH	5000K	2,800	12" L x 7-12" W x 6-3/4" H

°DLC Standard ♦DLC Premium  
Subject to Change.





C-AR-A-SQT3  
C-AR-A-SQT5  
C-AR-A-SQT7

## SHOEBOX LED AREA LIGHTS, 120-277V

Stylish, Modern Design; Type III, V and VII Optimized Distributions

- Category: LED Outdoor Area Light
- CRI: >70
- Location Type: Wet
- Voltage: 120-277V
- High LPW: up to 143
- Watts: 119
- Non-Dimmable
- Finish Colour: Dark Bronze

Item	SKU	Replaces	CCT	Lumens	Size
<b>C-LITE™ Type III Shoebox LED Area Light</b>					
LED Area Light	C-AR-A-SQT3-16L-40K-DB◆	320W PSMH / 400W MH	4000K	16,100	16-1/5" x 16-1/5"
LED Area Light	C-AR-A-SQT3-17L-50K-DB◆	320W PSMH / 400W MH	5000K	17,100	16-1/5" x 16-1/5"
<b>C-LITE™ Type V Shoebox LED Area Light</b>					
LED Area Light	C-AR-A-SQT5-15L-50K-DB◆	320W PSMH / 400W MH	5000K	15,200	16-1/5" x 16-1/5"
LED Area Light	C-AR-A-SQT5-16L-40K-DB◆	320W PSMH / 400W MH	4000K	16,100	16-1/5" x 16-1/5"
<b>C-LITE™ Type VII Shoebox LED Area Light</b>					
LED Area Light	C-AR-A-SQT7-17L-50K-DB◆	320W PSMH / 400W MH	5000K	16,900	16-1/5" x 16-1/5"
LED Area Light	C-AR-A-SQT7-17L-40K-DB◆	320W PSMH / 400W MH	4000K	16,900	16-1/5" x 16-1/5"



° DLC Standard ◆ DLC Premium  
Subject to Change.



LED Adjustable U-Bracket



LED 6" Mounting Arm



LED Mount Slipfitter 2in



LED Mounting Arm Kit



LED Photocell 120V/208V/240V/277V

## LED AREA LIGHT ACCESSORIES, 120-277V

### Accessories for C-Lite™ Area Lights

- Category: LED Outdoor Accessories

Product/Item	SKU	Finish Colour	Size/Fits
LED Adjustable U-Bracket	C-ACC-A-AUB-2X5X6-DB	Dark Bronze	Fits C-AR-A-2LD Series, 2" X 5" X 6"
LED 6" Mounting Arm	C-ACC-A-MTARM-6IN-DB	Dark Bronze	6in, Fits C-AR-A-2LD, C-AR-A-4LD Series
LED Adjustable U-Bracket	C-ACC-A-AUB-3X5X5-DB	Dark Bronze	Fits C-AR-A-4LD Series, 3" X 5" X 5"
LED Mount Slipfitter 2"	C-ACC-A-MTSL-2IN-DB	Dark Bronze	2in, Fits C-AR-A-2LD, C-AR-A-4LD, C-AR-A-SQT5, C-AR-A-SQT7 Series
LED 6" Mounting Arm	C-ACC-A-SBMTARM-6IN-DB	Dark Bronze	Fits C-AR-A-SQT3, C-AR-A-SQT5, C-AR-A-SQT7 Series
LED Mounting Arm Kit	C-ACC-A-SMDDPOLE-GR	Gray	For C-AR-A-DD-3L Series
LED Adjustable U-Bracket	C-ACC-A-AUB-DB	Dark Bronze	Fits C-AR-A-SQT3, AR-A-SQT5, C-AR-A-SQT7 Series
LED Photocell 120V	C-ACC-A-PCELL-LV	-	120V, Fits C-AR-A-2LD, C-AR-A-4LD, C-AR-A-SQT3, C-AR-A-SQT5, C-AR-A-SQT7 Series
LED Photocell 208-240V	C-ACC-A-PCELL-HV-TL	-	208-277V, Fits C-AR-A-2LD, C-AR-A-4LD, C-AR-A-SQT3, C-AR-A-SQT5, C-AR-A-SQT7 Series

## LED CANOPY LIGHTS, 120-277V

### Traditional Style; Easy Installation

- Category: LED Outdoor Canopy
- CRI: >70
- Location Type: Wet
- High LPW: Up to 136
- Watts: 36 to 67
- Non-Dimmable

Item	SKU	Replaces	CCT	Lumens	Finish Colour	Size/Fits
------	-----	----------	-----	--------	---------------	-----------

#### C-LITE™ Square Canopy - Small - Wide Distribution

Square LED Canopy Small	C-CP-A-SQ-49L-40K-DB <sup>o</sup>	100W PSMH	4000K	4900	Dark Bronze	Hole Size: 9-7/8" x 9-7/8"
Square LED Canopy Small	C-CP-A-SQ-49L-40K-WH <sup>o</sup>	100W PSMH	4000K	4900	White	Hole Size: 9-7/8" x 9-7/8"
Square LED Canopy Small	C-CP-A-SQ-49L-50K-DB <sup>o</sup>	100W PSMH	5000K	4900	Dark Bronze	Hole Size: 9-7/8" x 9-7/8"
Square LED Canopy Small	C-CP-A-SQ-49L-50K-WH <sup>o</sup>	100W PSMH	5000K	4900	White	Hole Size: 9-7/8" x 9-7/8"



C-CP-A-SQ-49L  
Small, Dark Bronze

#### C-LITE™ Square Canopy - Medium - Wide Distribution

Square LED Canopy Large	C-CP-A-SQ-79L-40K-DB <sup>o</sup>	150W PSMH 175W MH 200W MH	4000K	7900	Dark Bronze	Hole Size: 13-1/3" x 13-1/3"
Square LED Canopy Large	C-CP-A-SQ-79L-40K-WH <sup>o</sup>	150W PSMH 175W MH 200W MH	4000K	7900	White	Hole Size: 13-1/3" x 13-1/3"
Square LED Canopy Large	C-CP-A-SQ-79L-50K-DB <sup>o</sup>	150W PSMH 175W MH 200W MH	5000K	7900	Dark Bronze	Hole Size: 13-1/3" x 13-1/3"
Square LED Canopy Large	C-CP-A-SQ-79L-50K-WH <sup>o</sup>	150W PSMH 175W MH 200W MH	5000K	7900	White	Hole Size: 13-1/3" x 13-1/3"



C-CP-A-SQ-79L  
Medium, Dark Bronze



<sup>o</sup> DLC Standard ♦ DLC Premium  
Subject to Change.


## COMPACT LED FLOODLIGHTS, 120-277V

High Quality; Easy Installation; 5 Year Limited Warranty\*

- Category: LED Outdoor Floodlights/Spot Lights
- CRI: >70
- Location Type: Wet
- Non-Dimmable
- High LPW: Up to 106
- Watts: 9 to 35



C-FL-A-RC-2L  
Small, White

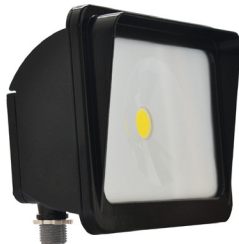

C-FL-A-RC-3L  
Large, Dark Bronze



C-FL-A-RDC  
Small, Black



C-FL-A-RDW  
Wide



C-FL-A-RDM  
Medium

Item	SKU	Replaces	CCT	Lumens	Finish Colour	Size/Fits
<b>C-LITE™ Premium LED Compact Flood - Small</b>						
Premium LED Compact Flood Small	C-FL-A-RC-2L-40K-DB	50W MH	4000K	1,600	Dark Bronze	4-3/4" H x 6-1/8" W x 4-3/4" D
Premium LED Compact Flood Small	C-FL-A-RC-2L-40K-WH	50W MH	4000K	1,600	White	4-3/4" H x 6-1/8" W x 4-3/4" D
<b>C-LITE™ Premium LED Compact Flood - Large</b>						
Premium LED Compact Flood Large	C-FL-A-RC-3L-40K-DB <sup>o</sup>	100W PSMH	4000K	2,900	Dark Bronze	6" H x 7-3/4" W x 4-3/4" D
Premium LED Compact Flood Large	C-FL-A-RC-3L-40K-WH <sup>o</sup>	100W PSMH	4000K	2,900	White	6" H x 7-3/4" W x 4-3/4" D
Premium LED Compact Flood Large	C-FL-A-RC-3L-50K-DB <sup>o</sup>	100W PSMH	5000K	2,900	Dark Bronze	6" H x 7-3/4" W x 4-3/4" D
Premium LED Compact Flood Large	C-FL-A-RC-3L-50K-WH <sup>o</sup>	100W PSMH	5000K	2,900	White	6" H x 7-3/4" W x 4-3/4" D
<b>C-LITE™ Premium LED Directional Flood - Small</b>						
Premium LED Directional Flood Small	C-FL-A-RDC-1L-40K-BK	50W Halogen	4000K	700	Black	4" H x 4" W x 4-5/8" D
Premium LED Directional Flood Small	C-FL-A-RDC-1L-40K-WH	50W Halogen	4000K	700	White	4" H x 4" W x 4-5/8" D
<b>C-LITE™ Premium LED Directional Flood - Wide</b>						
Premium LED Directional Flood Wide	C-FL-A-RDW-3L-40K-DB <sup>o</sup>	100W PSMH / 70W MH	4000K	3,200	Dark Bronze	7-2/5" H x 6" W x 8-1/2" D
Premium LED Directional Flood Wide	C-FL-A-RDW-3L-50K-DB <sup>o</sup>	100W PSMH / 70W MH	5000K	3,400	Dark Bronze	7-2/5" H x 6" W x 8-1/2" D
<b>C-LITE™ Premium LED Directional Flood - Medium</b>						
Premium LED Directional Flood Medium	C-FL-A-RDM-3L-40K-DB <sup>o</sup>	100W PSMH / 70W MH	4000K	3,500	Dark Bronze	7-2/5" H x 6" W x 8-1/2" D
Premium LED Directional Flood Medium	C-FL-A-RDM-4L-50K-DB <sup>o</sup>	100W PSMH / 70W MH	5000K	3,800	Dark Bronze	7-2/5" H x 6" W x 8-1/2" D

<sup>o</sup>DLC Standard ♦DLC Premium  
Subject to Change.







C-FL-A-RTF1  
Small, Wide



C-FL-A-RTS1  
Small, Narrow



C-FL-A-RTF2  
Large, Wide



C-FL-A-RTF4  
High-Output, Wide



LED Photocell 120V-270V

## HIGH PERFORMANCE LED FLOODLIGHTS & ACCESSORIES, 120-277V

**High Quality; Easy Installation; 5 Year Limited Warranty\***

- Category: LED Outdoor Floodlights & Accessories
- CRI: >70
- Location Type: Wet
- Non-Dimmable
- Finish Colour: Dark Bronze
- High LPW: Up to 118
- Watts: 74 to 234

Item	SKU	Replaces	CCT	Lumens	Size/Fits
<b>C-LITE™ Premium LED Flood - Small, Wide</b>					
Premium LED Floodlight-Small	C-FL-A-RTF1-8L-40K-DB°	150W PSMH / 175W MH	4000K	8,100	11" H x 9-4/9" W x 5-1/2" D
Premium LED Floodlight-Small	C-FL-A-RTF1-7L-50K-DB°	150W PSMH / 175W MH	5000K	7,400	11" H x 9-4/9" W x 5-1/2" D
<b>C-LITE™ Premium LED Flood - Small, Narrow</b>					
Premium LED Floodlight-Small	C-FL-A-RTS1-8L-40K-DB°	150W PSMH / 175W MH	4000K	8,000	11" H x 9-4/9" W x 5-1/2" D
Premium LED Floodlight-Small	C-FL-A-RTS1-7L-50K-DB°	150W PSMH / 175W MH	5000K	7,300	11" H x 9-4/9" W x 5-1/2" D
<b>C-LITE™ Premium LED Flood - Large, Wide</b>					
Premium LED Floodlight-Large	C-FL-A-RTF2-12L-40K-DB°	250W PSMH	4000K	12,300	14-5/8" H x 12-3/4" W x 7-3/8" D
Premium LED Floodlight-Large	C-FL-A-RTF2-12L-50K-DB°	250W PSMH	5000K	12,400	14-5/8" H x 12-3/4" W x 7-3/8" D
<b>C-LITE™ Premium LED Flood - Large, Narrow</b>					
Premium LED Floodlight-Large	C-FL-A-RTS2-13L-40K-DB°	250W PSMH	4000K	13,600	14-5/8" H x 12-3/4" W x 7-3/8" D
Premium LED Floodlight-Large	C-FL-A-RTS2-14L-50K-DB°	250W PSMH	5000K	13,900	14-5/8" H x 12-3/4" W x 7-3/8" D
<b>C-LITE™ High-Output LED Flood - Wide</b>					
High-Output LED Floodlight	C-FL-A-RTF4-26L-40K-DB°	400W PSMH	4000K	26,500	16-1/16" H x 17-3/4" W x 7-5/16" D
High-Output LED Floodlight	C-FL-A-RTF4-26L-50K-DB°	400W PSMH	5000K	26,300	16-1/16" H x 17-3/4" W x 7-5/16" D
<b>C-LITE™ High-Output LED Flood - Narrow</b>					
High-Output LED Floodlight	C-FL-A-RTS4-23L-40K-DB°	400W PSMH	4000K	22,900	16-1/16" H x 17-3/4" W x 7-5/16" D
High-Output LED Floodlight	C-FL-A-RTS4-23L-50K-DB°	400W PSMH	5000K	22,800	16-1/16" H x 17-3/4" W x 7-5/16" D
<b>ACCESSORIES</b>					
LED Photocell 120V	C-ACC-A-PCCELL-LV				120V, Fits C-FL-A-RTF2, C-FL-A-RTS2, C-FL-A-RTF4, C-FL-A-RTS4, C-WP-A Series
LED Photocell 208-240V	C-ACC-A-PCCELL-HV				208-240V, Fits C-FL-A-RTF2, C-FL-A-RTS2, C-FL-A-RTF4, C-FL-A-RTS4, C-WP-A Series



° DLC Standard ♦ DLC Premium  
Subject to Change.

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details



## LED WALL MOUNTS, 120V

Easy Installation; Versatile; Efficient

- Category: LED Outdoor Wall Mounts with Photocell
- CRI: >70
- Location Type: Wet
- Non-Dimmable
- High LPW: Up to 97
- Watts: 14 to 36



C-WM-A-WLAR  
Architectural



C-WM-A-WLCY  
Cylinder



C-WM-A-WLHR



C-WM-A-WLHO  
High-Output



C-WM-A-WLSL



C-WM-A-WLSP  
Spherical

Item	SKU	Replaces	CCT	Lumens	Finish Colour	Size/Fits
<b>C-LITE™ Architectural Wall Mount</b>						
Architectural Wall Mount (120-277V)	C-WM-A-WLAR-11L-50K-MB	100W Incandescent	5000K	1,100	Medium Bronze	Size: 6" H x 5-2/5" W x 7-1/4" L
<b>C-LITE™ Wall Mount - Cylinder</b>						
Wall Mount Cylinder	C-WM-A-WLCY-6L-40K-WH	60W Incandescent	4000K	600	White	Size: 9-1/3" H x 4-3/4" W x 6-1/2" D
Wall Mount Cylinder	C-WM-A-WLCY-6L-40K-DB	60W Incandescent	4000K	600	Dark Bronze	Size: 9-1/3" H x 4-3/4" W x 6-1/2" D
<b>C-LITE™ Wall Mount - 1,000/1,200 Lumens</b>						
Wall Mount	C-WM-A-WLHR-10L-40K-MB	100W Incandescent	4000K	1,000	Medium Bronze	Size: 9" H x 5-3/4" W x 4" D
Wall Mount	C-WM-A-WLHR-10L-40K-WH	100W Incandescent	4000K	1,000	White	Size: 9" H x 5-3/4" W x 4" D
Wall Mount	C-WM-A-WLHR-12L-40K-MB	120W Incandescent	4000K	1,200	Medium Bronze	Size: 9" H x 5-3/4" W x 4" D
Wall Mount	C-WM-A-WLHR-12L-40K-WH	120W Incandescent	4000K	1,200	White	Size: 9" H x 5-3/4" W x 4" D
<b>C-LITE™ Wall Mount - High-Output</b>						
High-Output Wall Mount	C-WM-A-WLHO-34L-40K-MB	100W PSMH	4000K	3,400	Medium Bronze	Size: 11" H x 7-1/8" W x 4-1/4" D
High-Output Wall Mount	C-WM-A-WLHO-36L-50K-MB	100W PSMH	5000K	3,600	Medium Bronze	Size: 11" H x 7-1/8" W x 4-1/4" D
<b>C-LITE™ Wall Mount - 1,500 Lumens</b>						
Wall Mount	C-WM-A-WLSL-14L-50K-MB	120W Incandescent	5000K	1,400	Medium Bronze	Size: 12-3/5" H x 7-3/4" W x 4-3/5" D
<b>C-LITE™ Wall Mount - Spherical</b>						
Wall Mount Spherical	C-WM-A-WLSP-8L-40K-WH	75W Incandescent	4000K	800	White	Size: 9-4/5" H x 4-2/5" W x 5-4/5" L
Wall Mount Spherical	C-WM-A-WLSP-8L-40K-DB	75W Incandescent	4000K	800	Dark Bronze	Size: 9-4/5" H x 4-2/5" W x 5-4/5" L

## SLIMLINE LED WALL PACKS, 120-277V

**Efficient; Architectural Design; Easy Installation; 5 Year Limited Warranty\***

- Category: LED Outdoor Wall Packs
- CR1: >70
- Location Type: Wet
- Non-Dimmable
- Finish Colour: Dark Bronze
- High LPW: Up to 105
- Watts: 40 to 150

Item	SKU	Replaces	CCT	Lumens	Watts	Size/Fits
<b>C-LITE™ Architectural Slim Wall Pack - Small</b>						
Architectural Slim	C-WP-A-SL-4L-40K-DB°	100W PSMH	4000K	3,900	40	Size: 8" H x 7-1/2" W x 2-4/5" L
Architectural Slim	C-WP-A-SL-4L-50K-DB°	100W PSMH	5000K	3,900	40	Size: 8" H x 7-1/2" W x 2-4/5" L
<b>C-LITE™ Architectural Slim Wall Pack - Medium</b>						
Architectural Slim	C-WP-A-SL-8L-40K-DB°	250W MH	4000K	8,100	80	Size: 12-4/5" H x 14-1/5" W x 5" L
Architectural Slim	C-WP-A-SL-8L-50K-DB°	250W MH	5000K	8,100	80	Size: 12-4/5" H x 14-1/5" W x 5" L
<b>C-LITE™ Architectural Slim Wall Pack - Large</b>						
Architectural Slim	C-WP-A-SL-16L-40K-DB°	320W PSMH / 400W MH	4000K	15,800	150	Size: 12-4/5" H x 14-1/5" W x 5" L
Architectural Slim	C-WP-A-SL-16L-50K-DB°	320W PSMH / 400W MH	5000K	15,800	150	Size: 12-4/5" H x 14-1/5" W x 5" L



C-WP-A-SL-4L  
Small



C-WP-A-SL-8L  
Medium



C-WP-A-SL-16L  
Large



° DLC Standard ♦ DLC Premium  
Subject to Change.

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details

## SLIMLINE LED WALL PACK ACCESSORIES, 120-277V

Efficient; Architectural Design; Easy Installation; 5 Year Limited Warranty\*

• Category: LED Outdoor Accessories



LED Photocell, 120V



Adjustable U-Bracket Mount Kit



Adjustable Slip Fitter



Adjustable Swivel Fitter



Adjustable U-Bracket



Surface Mounting Box

Item	SKU	Size/Fits
LED Photocell, 120V	C-ACC-A-PCCELL-LV	120V, Fits C-FL-A-RTF2, C-FL-A-RTS2, C-FL-A-RTF4, C-FL-A-RTS4, C-WP-A Series
LED Photocell, 208-277V	C-ACC-A-PCCELL-HV	208-277V, Fits C-WP-A -SL Series
Adjustable U-Bracket	C-ACC-A-AUBAS-LG-DB	For Slimline Wallpacks C-WP-A-SL-8L/16L Series
Adjustable Slip Fitter	C-ACC-A-2SFAS-SM-DB	2", For Slimline Wallpacks C-WP-A-SL-4L Series
Adjustable Swivel Fitter	C-ACC-A-12SFAS-SM-DB	1/2" NPS, For Slimline Wallpacks C-WP-A-SL-4L Series
Adjustable U-Bracket	C-ACC-A-AUBAS-LG-DB	For Slimline Wallpacks C-WP-A-SL-8L/16L Series
Adjustable Slip Fitter	C-ACC-A-2SFAS-LG-DB	2", For Slimline Wallpacks C-WP-A-SL-8L/16L Series
Surface Mounting Box	C-ACC-A-SMBAS-DB	For Slimline Wallpacks C-WP-A-SL-4L, C-WP-A-SL-8L/16L Series

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details



C-WP-A-TRAD-3L  
Small, Non-Cutoff



C-WP-A-TRAD-8L  
Large, Non-Cutoff



C-WP-A-TR-1L  
Non-Cutoff



C-WP-A-TR-12L  
Large, Non-Cutoff



C-WP-A-TR-15L  
High-Output, Non-Cutoff



C-WP-A-TRFC  
Medium, Full-Cutoff



C-WP-A-FCT3-3L  
Small, Full-Cutoff



C-WP-A-FCT3-6L  
Medium, Full-Cutoff



C-WP-A-FCT3-18L  
Full-Cutoff

## LED WALL PACKS, 120-277V

Efficient; Easy Installation; 5 Year Limited Warranty\*

- Category: LED Outdoor Wall Packs
- CR1: >70
- Location Type: Wet
- Non-Dimmable
- Finish Colour: Dark Bronze
- High LPW: Up to 144
- Watts: 20 to 157

Item	SKU	Replaces	CCT	Lumens	Watts	Size/Fits
<b>C-LITE™ Traditional Style Non-Cutoff - 3,400 Lumens - Small</b>						
Traditional (non cutoff)	C-WP-A-TRAD-3L-40K-DB	100W PSMH	4000K	3,200	33	Size: 9-1/4" H x 14-1/8" W x 7-1/2" D
Traditional (non cutoff)	C-WP-A-TRAD-3L-50K-DB	100W PSMH	5000K	3,400	33	Size: 9-1/4" H x 14-1/8" W x 7-1/2" D
<b>C-LITE™ Traditional Style Non-Cutoff - 8,900 Lumens - Large</b>						
Traditional (non cutoff)	C-WP-A-TRAD-8L-40K-DB	250W MH	4000K	8,600	85	Size: 9-3/4" H x 18" W x 9-3/8" D
Traditional (non cutoff)	C-WP-A-TRAD-8L-50K-DB	250W MH	5000K	8,900	87	Size: 9-3/4" H x 18" W x 9-3/8" D
<b>C-LITE™ Traditional Style Non-Cutoff - 1,300 Lumens</b>						
Traditional (non cutoff) 120V only	C-WP-A-TR-1L-40K-DB	50W MH	4000K	1,300	20	Size: 8-9/16" H x 7-3/16" W x 7-5/16" L
<b>C-LITE™ Traditional Style Non Cutoff - 12,500 Lumens - Large</b>						
Traditional (non cutoff)	C-WP-A-TR-12L-40K-DB	250W MH	4000K	13,000	108	Size: 9-5/6" H x 18" W x 9-3/8" D
Traditional (non cutoff)	C-WP-A-TR-12L-50K-DB	250W MH	5000K	13,100	108	Size: 9-5/6" H x 18" W x 9-3/8" D
<b>C-LITE™ Traditional Style Non-Cutoff - 15,300 Lumens - High Output</b>						
Traditional (non cutoff)	C-WP-A-TR-15L-40K-DB	320W PSMH / 400W MH	4000K	15,000	119	Size: 9-7/8" H x 18" W x 13" D
Traditional (non cutoff)	C-WP-A-TR-15L-50K-DB	320W PSMH / 400W MH	5000K	15,300	119	Size: 9-7/8" H x 18" W x 13" D
<b>C-LITE™ Traditional Style Full-Cutoff - 6,600 Lumens - Medium</b>						
Traditional (full cutoff)	C-WP-A-TRFC-6L-40K-DB	150W PSMH / 175W MH	4000K	6,400	66	Size: 14-1/4" D x 9-1/4" W x 9" H
Traditional (full cutoff)	C-WP-A-TRFC-6L-50K-DB	150W PSMH / 175W MH	5000K	6,600	66	Size: 14-1/4" D x 9-1/4" W x 9" H
<b>C-LITE™ Premium Full-Cutoff Wall Pack - 3,600 Lumens - Small</b>						
Premium (full cutoff)	C-WP-A-FCT3-3L-40K-DB	100W PSMH	4000K	3,500	33	Size: 4-1/2" H x 8-3/4" W x 9-1/2" D
Premium (full cutoff)	C-WP-A-FCT3-3L-50K-DB	100W PSMH	5000K	3,600	33	Size: 4-1/2" H x 8-3/4" W x 9-1/2" D
<b>C-LITE™ Premium Full-Cutoff Wall Pack - 6,200 Lumens - Medium</b>						
Premium (full cutoff)	C-WP-A-FCT3-6L-40K-DB	150W PSMH / 175W MH	4000K	6,000	65	Size: 4-11/16" H x 10" W x 10-5/16" D
Premium (full cutoff)	C-WP-A-FCT3-6L-50K-DB	150W PSMH / 175W MH	5000K	6,200	66	Size: 4-11/16" H x 10" W x 10-5/16" D
<b>C-LITE™ Premium Full-Cutoff Wall Pack - 18,000 Lumens</b>						
Premium (full cutoff)	C-WP-A-FCT3-18L-40K-DB	320W PSMH / 400W MH	4000K	18,000	157	Size: 5-1/2" H x 13-1/2" W x 12-1/2" D
Premium (full cutoff)	C-WP-A-FCT3-18L-50K-DB	320W PSMH / 400W MH	5000K	18,000	157	Size: 5-1/2" H x 13-1/2" W x 12-1/2" D



° DLC Standard ♦ DLC Premium  
Subject to Change.

\*See cree.com/canada/warranty for details



LED Photocell, 120V

## LED WALL PACK ACCESSORIES, 120-277V

Efficient; Easy Installation; 5 Year Limited Warranty\*

- Category: LED Outdoor Accessories

Item	SKU	Size/Fits
LED Photocell, 120V	C-ACC-A-PCCELL-LV	120V, Fits C-WP-A Series
LED Photocell, 208-277V	C-ACC-A-PCCELL-HV	208-277V, Fits C-WP-A-TRAD/TRFC/TR Series
LED Photocell, 208-277V	C-ACC-A-PCCELL-HV-TL	208-277V, Fits C-WP-A FCT3 Series

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details

## LED VAPOR TIGHTS, 120V

Efficient; Traditional Design; Easy To Install; 5 Year Limited Warranty\*

- Category: LED Outdoor Vapor Tights
- CRI: >70
- Location Type: Wet
- Non-Dimmable
- High LPW: Up to 98
- Watts: 14 to 48



Small Large  
LED Vapor Pendant Mounts



Small Large  
LED Vapor Ceiling Mounts



Small Large  
LED Vapor Wall Mounts

Item	SKU	Replaces	CCT	Lumens	Finish Colour	Size/Fits
------	-----	----------	-----	--------	---------------	-----------

### C-LITE™ Vapor Tight - Pendant Mount

LED Vapor Tight, Small Pendant Mount	C-VT-A-SMPD-9L-40K-GR	100W Incandescent	4000K	900	GR = Gray	10" H x 4-1/2" Diameter
LED Vapor Tight, Large Pendant Mount	C-VT-A-LGPD-12L-40K-GR	120W Incandescent	4000K	1200	GR = Gray	12-2/5" H x 5-4/5" Diameter

### C-LITE™ Vapor Tight - Ceiling Mount

LED Vapor Tight, Small Ceiling Mount	C-VT-A-SMCL-9L-40K-GR	100W Incandescent	4000K	900	GR = Gray	9-1/3" H x 4-1/2" Diameter
LED Vapor Tight, Large Ceiling Mount	C-VT-A-LGCL-12L-40K-GR	120W Incandescent	4000K	1200	GR = Gray	11-3/5" H x 5-4/5" Diameter

### C-LITE™ Vapor Tight - Wall Mount

LED Vapor Tight, Small Wall Mount	C-VT-A-SMWL-9L-40K-GR	100W Incandescent	4000K	900	GR = Gray	10" H x 4-2/5" W x 5-4/5" L
LED Vapor Tight, Large Wall Mount	C-VT-A-LGWL-12L-40K-GR	120W Incandescent	4000K	1200	GR = Gray	12-2/5" H x 5-4/5" W x 9" L

## LED VAPOR TIGHT ACCESSORIES

Accessories for C-Lite LED Vapor Tights (NOT FOR USE WIT VAPOR WALL MOUNTS)



LED Vapor Tight Shroud

Item	SKU	Finish Colour	Size/Fits
LED Vapor Tight, Small Shroud	C-ACC-A-VTSHR-SM-GR	GR = Gray	Small, For C-VT-A-SMCL, C-VT-A-SMPD Series
LED Vapor Tight, Large Shroud	C-ACC-A-VTSHR-LG-GR	GR = Gray	Large, For C-VT-A-LGCL, C-VT-A-LGPD Series

\*See cree.com/canada/warranty for details

## LED FLAT PANEL TROFFER, 120V-277V

Efficient; Traditional Design; Easy To Install; 5 Year Limited Warranty\*

- Category: LED Indoor Troffers
- Dimmable
- CRI: 80
- High LPW: Up to 100
- Location Type: Damp
- Watts: 40 to 50
- White



1' x 4' Flat Panel Troffer



2' x 2' Flat Panel Troffer



2' x 4' Flat Panel Troffer

Item	SKU	Replaces	CCT	Lumens	Finish Colour	Size/Fits
<b>C-LITE™ 1' x 4' Flat Panel</b>						
LED Flat Panel	C-TR-A-FP14-40L-35K-WH <sup>o</sup>	2 x F32T8	3500K	4000	White	47-3/4" L x 11-3/4" W x 1/2" H (Panel) 47-3/4" L x 11-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP14-40L-40K-WH <sup>o</sup>	2 x F32T8	4000K	4000	White	47-3/4" L x 11-3/4" W x 1/2" H (Panel) 47-3/4" L x 11-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP14-40L-50K-WH <sup>o</sup>	2 x F32T8	5000K	4000	White	47-3/4" L x 11-3/4" W x 1/2" H (Panel) 47-3/4" L x 11-3/4" W x 1-3/4" H (w/Driver)
<b>C-LITE™ 2' x 2' Flat Panel</b>						
LED Flat Panel	C-TR-A-FP22-40L-35K-WH <sup>o</sup>	2 x F32T8/U6	3500K	4000	White	23-3/4" L x 23-3/4" W x 1/2" H (Panel) 23-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP22-40L-40K-WH <sup>o</sup>	2 x F32T8/U6	4000K	4000	White	23-3/4" L x 23-3/4" W x 1/2" H (Panel) 23-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP22-40L-50K-WH <sup>o</sup>	2 x F32T8/U6	5000K	4000	White	23-3/4" L x 23-3/4" W x 1/2" H (Panel) 23-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)
<b>C-LITE™ 2' x 4' Flat Panel</b>						
LED Flat Panel	C-TR-A-FP24-50L-35K-WH <sup>o</sup>	3 x F32T8	3500K	5000	White	47-3/4" L x 23-3/4" W x 1/2" H (Panel) 47-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP24-50L-40K-WH <sup>o</sup>	3 x F32T8	4000K	5000	White	47-3/4" L x 23-3/4" W x 1/2" H (Panel) 47-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)
LED Flat Panel	C-TR-A-FP24-50L-50K-WH <sup>o</sup>	3 x F32T8	5000K	5000	White	47-3/4" L x 23-3/4" W x 1/2" H (Panel) 47-3/4" L x 23-3/4" W x 1-3/4" H (w/Driver)

<sup>o</sup>DLC Standard ♦DLC Premium  
Subject to Change.

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details





## LED ROUND HIGH BAYS & LOW BAYS, 120-277V

Easy Installation; High Efficiency; 5 Year Limited Warranty\*

- Category: LED Indoor High Bays and Low Bays
- CRI: >70
- Location Type: Damp
- Non-Dimmable
- Finish Colour: White
- High LPW: Up to 124
- Watts: 79 to 210



C-HB-A-RDAL  
High Bay with Aluminum Reflector



C-HB-A-RDPC  
High Bay with Prismatic Reflector



C-LB-A-RDAL  
Low Bay with Aluminum Reflector



C-LB-A-RDAC  
Low Bay with Prismatic Reflector

Item	SKU	Replaces	CCT	Lumens	Watts	Size/Fits
<b>C-LITE™ Round High Bay</b>						
LED Round High Bay	C-HB-A-RDAL-18L-50K-WH <sup>o</sup>	320W PSMH 400W MH	5000K	18,500	160	12" H x 16" Dia Includes White 16" Aluminum Reflector
LED Round High Bay	C-HB-A-RDPC-18L-50K-WH <sup>o</sup>	320W PSMH 400W MH	5000K	18,500	160	15-1/2" H x 16" Dia Includes 16" Polycarbonate Prismatic Diffuser
LED Round High Bay	C-HB-A-RDAL-26L-50K-WH <sup>o</sup>	400W PSMH	5000K	26,500	210	15-1/2" H x 16" Dia Includes 16" Polycarbonate Prismatic Diffuser
LED Round High Bay	C-HB-A-RDPC-26L-50K-WH <sup>o</sup>	400W PSMH	5000K	26,500	210	12" H x 16" Dia Includes White 16" Aluminum Reflector
<b>C-LITE™ Round Low Bay</b>						
LED Round Low Bay	C-LB-A-RDAL-8L-50K-WH <sup>◆</sup>	150W PSMH 175W MH	5000K	8,000	59	10" H x 14" W x 6-1/2" L Includes 14" Spun Aluminum Reflector
LED Round Low Bay	C-LB-A-RDAL-8L-40K-WH <sup>◆</sup>	150W PSMH 175W MH	4000K	8,000	59	10" H x 14" W x 6-1/2" L Includes 14" Spun Aluminum Reflector
LED Round Low Bay	C-LB-A-RDAC-8L-50K-WH <sup>◆</sup>	150W PSMH 175W MH	5000K	8,000	59	10" H x 14" W x 6-1/2" L Includes 14" Clear Acrylic Reflector
LED Round Low Bay	C-LB-A-RDAC-8L-40K-WH <sup>◆</sup>	150W PSMH 175W MH	4000K	8,000	59	10" H x 14" W x 6-1/2" L Includes 14" Clear Acrylic Reflector

<sup>o</sup> DLC Standard <sup>◆</sup> DLC Premium  
Subject to Change.

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details



## LED LINEAR HIGH BAYS, 120-277V

Easy Installation; High Efficiency; 5 Year Limited Warranty\*

- Category: LED Indoor Linear High Bays
- CRI: 80
- Location Type: Damp
- Non-Dimmable, 0-10V
- White
- High LPW: Up to 129
- Watts: 108 to 220



C-HB-A-L4F-20L-50K-WH



C-HB-A-L4F-28L-50K-WH



C-PHB-A-L2F-13L



C-PHB-A-L2F-20L



C-PHB-A-L4F-27L

Item	SKU	Replaces	CCT	Lumens	Watts	Size/Fits
------	-----	----------	-----	--------	-------	-----------

### C-LITE™ Linear High Bay

Linear High Bay	C-HB-A-L4F-20L-50K-WH◦	4-lamp T5HO 54W 8-lamp T8 32W	5000K	20,500	160	3-1/2" H x 12" W x 47-1/2" L
Linear High Bay	C-HB-A-L4F-28L-50K-WH◦	6-lamp T5HO 54W	5000K	28,500	220	3-1/2" H x 12" W x 47-1/2" L

### C-LITE™ Premium Linear High Bay - 13,000 Lumens

Premium Linear High Bay	C-PHB-A-L2F-13L-40K-WH◦	6-lamp T8 32W	4000K	13,000	108	3-3/5" H x 12-3/5" W x 23-4/5" L
Premium Linear High Bay	C-PHB-A-L2F-13L-50K-WH◦	6-lamp T8 32W	5000K	13,000	108	3-3/5" H x 12-3/5" W x 23-4/5" L

### C-LITE™ Premium Linear High Bay - 20,000 Lumens

Premium Linear High Bay	C-PHB-A-L2F-20L-40K-WH◦	4-lamp T5HO 54W 8-lamp T8 32W	4000K	20,000	160	3-3/5" H x 17-3/10" W x 23-4/5" L
Premium Linear High Bay	C-PHB-A-L2F-20L-50K-WH♦	4-lamp T5HO 54W 8-lamp T8 32W	5000K	20,000	160	3-3/5" H x 17-3/10" W x 23-4/5" L

### C-LITE™ Premium Linear High Bay - 27,000 Lumens

Premium Linear High Bay	C-PHB-A-L4F-27L-40K-WH◦	6-lamp T5HO 54W	4000K	27,000	220	3-3/5" H x 12-3/5" W x 46" L
Premium Linear High Bay	C-PHB-A-L4F-27L-50K-WH♦	6-lamp T5HO 54W	5000K	27,000	220	3-3/5" H x 12-3/5" W x 46" L

◦DLC Standard ♦DLC Premium  
Subject to Change.

\*See [cree.com/canada/warranty](http://cree.com/canada/warranty) for details






Premium Linear High Bay PIR Sensor



Premium Linear High Bay Pendant Mount Kit



Linear High Bay Frosted Lens

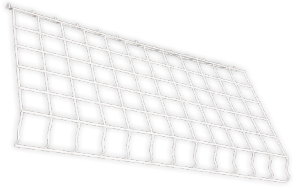

Premium Linear High Bay Wire Guard



LED Hook & Cord Kits



1/2" Hook

## LED HIGH & LOW BAY ACCESSORIES

### Accessories for C-Lite LED High & Low Bays

Item	SKU	Size/Fits
Premium Linear High Bay PIR Sensor	C-PHB-A-HBPIR	Suits C-PHB Series
Premium Linear High Bay Pendant Mount Kit	C-PHB-A-HBPM	Suits C-PHB Series
Linear High Bay Frosted Lens	C-HB-A-LHBFL-12X48	Suits C-HB Series 12" x 47-1/2" Fixtures
Premium Linear High Bay Wire Guard	C-PHB-A-LHBWG-12X24	Suits C-PHB Series 12-3/5" x 23-4/5" Fixtures
Premium Linear High Bay Wire Guard	C-PHB-A-LHBWG-18X24	Suits C-PHB Series 17-3/10" x 23-4/5" Fixtures
Premium Linear High Bay Wire Guard	C-PHB-A-LHBWG-12X46	Suits C-PHB Series 12-3/5" x 46" Fixtures
LED Hook & Cord Kit, 6 ft, 120-277V, No Plug	C-ACC-A-HKCRD-6FT-LV-NP	6ft, 120V-277V, No Plug, Fits 120-277V High Bays / Low Bays
LED Hook & Cord Kit, 6 ft, 120V, Twist Lock Plug	C-ACC-A-HKCRD-6FT-LV-TL	6ft, 120V, Twist Lock Plug, Fits 120V High Bays / Low Bays
LED Hook & Cord Kit, 6 ft, 120V, Straight Blade Plug	C-ACC-A-HKCRD-6FT-LV-SB	6ft, 120V, Straight Blade Plug, Fits 120V High Bays / Low Bays
LED Hook & Cord Kit, 6 ft, 277V, Twist Lock Plug	C-ACC-A-HKCRD-6FT-HV-TL	6ft, 277V, Twist Lock Plug, Fits 277V High Bays / Low Bays
LED Hook & Cord, 208-240V, Twist Lock Plug	C-ACC-A-HKCRD-6FT-MV-TL	6ft, 208-240V, Twist Lock Plug, Fits 208-240V High Bays / Low Bays
1/2" Hook	C-ACC-A-HK12	1/2", Fits High Bays / Low Bays



Cord, 6 ft. Straight Blade Plug



Cord, 6 ft, Twist Lock Plug



Receptacle, 15A, Twist Lock

## GENERAL LED ACCESSORIES, 120-277V

Quality; Reliability

Item	SKU	Size/Fits
LED Cord w-Strain Relief	C-ACC-A-CRDS-6FT-LV-TL	6ft, 120V, Twist Lock Plug, Fits any 120V Fixture
LED Cord w-Strain Relief	C-ACC-A-CRDS-6FT-LV-SB	6ft, 120V, Straight Blade Plug, Fits any 120V Fixture
LED Cord w-Strain Relief	C-ACC-A-CRDS-6FT-HV-TL	6ft, 277V, Twist Lock Plug, Fits any 277V Fixture
LED Cord w-Strain Relief	C-ACC-A-CRDS-6FT-MV-TL	6ft, 208-240V, Twist Lock Plug, Fits any 208-240V Fixture
LED Cord	C-ACC-A-CRD-6FT-LV-TL	6ft, 120V, Twist Lock Plug, Fits any 120V Fixture
LED Cord	C-ACC-A-CRD-6FT-LV-SB	6ft, 120V, Straight Blade Plug, Fits any 120V Fixture
LED Cord	C-ACC-A-CRD-6FT-MV-TL	6ft, 208-240V, Twist Lock Plug, Fits any 208-240V Fixture
LED Cord	C-ACC-A-CRD-6FT-HV-TL	6ft, 277V, Twist Lock Plug, Fits any 277V Fixture
LED Receptacle	C-ACC-A-RECEP-LV-TL	3-Wire, 15A / 120V, Twist Lock
LED Receptacle	C-ACC-A-RECEP-HV-TL	3-Wire, 15A / 277V, Twist Lock
LED Receptacle	C-ACC-A-RECEP-MV-TL	3-Wire, 15A / 208-240V, Twist Lock

Learn more at: [c-lite.ca](http://c-lite.ca) | 800.473.1234

©2018 Cree, Inc. All rights reserved. For informational purposes only. Not a warranty or specification. C-Lite™ and the C-Lite logo are trademarks of Cree Inc. CAT/C-LITE-0514

**C-LITE**<sup>™</sup>  
LED LIGHTING BY **CREE**