



# NEBO<sup>®</sup>

ILLUMINATE YOUR WORLD



2018 SPRING/SUMMER CATALOG

# NEW from NEBO

*the leader in lighting innovation*

We are pleased to present to you the latest in innovative lighting from NEBO. These new items represent a broad cross section of lighting types – all featuring the most advanced design and engineering created by NEBO's product development & design team. This season's new product line-up includes a total of nine new lights, each with unique features that meet the needs of today's varied and active lifestyles.



REDLINE BIG DADDY  
pg. 6-7



BIG CRYKET  
pg. 20-21



TANGO  
pg. 18-19



REBEL  
pg. 10-11



SLIM  
pg. 4-5



LEO  
pg. 14-15



GLOW  
pg. 16-17



Flipit 400  
pg. 12-13

Our new lights include the versatile **LEO Work Light & Spot Light**, the bigger, brighter and better **BIG CRYKET**, the rechargeable **TANGO Work Light and Spot Light**, and the handy **GLOW Light + Tumbler Handle**, the household favorite **EYE Light**, the versatile **REBEL Task Light and Head Lamp**, the **SLIM Rechargeable Pocket Task Light**, the brightest REDLINE to date, the powerful **REDLINE BIG DADDY** flashlight, and the newest Flipit, the **Flipit400**. With so many new lights, NEBO is sure to have a light for every one of your customers.



@NEBOTOOLS



/NEBOTOOLS



@NEBOTOOLS



/NEBOTOOLS

# NEBO<sup>®</sup> SLIM



The NEBO SLIM is a thin, ergonomic rechargeable pocket light that outputs 500 lumens of intense bright light. Equipped with full dimming and Power Memory Recall, the SLIM also features a pocket clip, collapsible hanging hook and powerful magnetic base for convenient hands-free lighting.

- 1 LIGHT MODE - with Dimming**
- 100% (500 lumens) - 2 hours / 58 meters
  - 10% (50 lumens) - 10 hours / 18 meters

#### DESIGN

- Fully rechargeable
- Full dimming
- Anodized aircraft-grade aluminum; water and impact-resistant
- Collapsible hanging hook
- Belt/pocket clip
- Memory Power Setting
- Battery charging indicator
- Powerful magnetic base

#### OPERATION

- Side-positioned, ON/OFF button; hold to dim
- Lock-out mode to prevent accidental operation

#### ACCESSORIES

- Micro USB to USB charging cable included

#### BATTERIES

- Powered by rechargeable battery (included)
- (Recharge time: 5 - 6 hours)

#### SPECS

- 0.25 lbs.
- (H) 4.1" x (W) 1.77" x (D) 1.25"



A new innovation in LED technology, C-O-B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C-O-B outperforms traditional lighting with more output, less energy consumption and longer LED life span.

#### ASSORTED COLORS



• Display showcases 3 pieces in front - additional pieces can be stored in the back of the display.

• Each SLIM comes with a gift box

**Display Dimensions**  
(H) 10.5" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
(H) 4.2" x (W) 1.9" x (D) 1.5"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932390	6694	SLIM Rechargeable Pocket Light	29.99	12 PIECES

# NEBO® REDLINE® BIG DADDY™

 WATERPROOF

The brightest flashlight ever created by NEBO is here – the REDLINE BIG DADDY. This completely waterproof (IPX7) flashlight features a powerful 2,000 lumen output, 4x adjustable zoom, 5 unique light modes and a convenient carry lanyard. The BIG DADDY, everything you could need in a flashlight, and then some!

## 5 LIGHT MODES

- HIGH (2000 lumens) - 3 hours / 346 meters
- MEDIUM (800 lumens) - 6 hours / 219 meters
- LOW (500 lumens) - 15 hours / 173 meters
- STROBE (2000 lumens) - 6 hours / 346 meters
- BEACON (2000 lumens) - 8 hours / 346 meters

## DESIGN

- Waterproof (IPX7)
- Convex lens
- Tactical edge
- 4x adjustable zoom
- Signature Red Ring®
- Anodized aircraft-grade aluminum; impact-resistant

## OPERATION

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

## ACCESSORIES

- Lanyard included

## BATTERIES

- Powered by 9 AA batteries (included)

## SPECS

- 1.325 lbs.
- Length: Compacted: 9" / Extended: 9.75"
- Diameter: (Head) 2.25" / (Barrel) 1.5"

## U.S. PATENT

- 659,869 S



- Display holds 3 pieces - additional pieces included as replenishments.

**Display Dimensions**  
(H) 13.75" x (W) 8.5" x (D) 9"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932376	6692	REDLINE® BIG DADDY	49.99	8 PIECES

# NEBO® eye<sup>light</sup>

The NEBO EYE Light is a perfectly versatile 220 lumen C·O·B work light that helps illuminate any space with just the right amount of light. The EYE magnetically rests inside of the base which allows for 360° rotation to direct the light wherever you need it most. The base is also magnetic and features a drywall screw hole for permanent mounting and hook & loop double-sided tape for additional mounting options. Each package contains two EYE Lights.

### 3 LIGHT MODES

- 100% (220 lumens) - 3 hours / 8.5 meters
- 30% (70 lumens) - 9 hours / 4.5 meters
- S.O.S. (220 lumens) - 10 hours / 8.5 meters

### DESIGN

- 360° rotating magnetic design
- Water and impact-resistant
- Powerful detachable magnetic base
- Drywall screw hole
- Hook & loop double-sided tape

### OPERATION

- Top-positioned, ON/OFF button

### BATTERIES


- Powered by 3 AAA batteries (included)

### SPECS

- 0.33 lbs.
- (H) 3.125" x (W) 3" x (D) 3"



A new innovation in LED technology, C·O·B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C·O·B outperforms traditional lighting with more output, less energy consumption and longer LED life span.

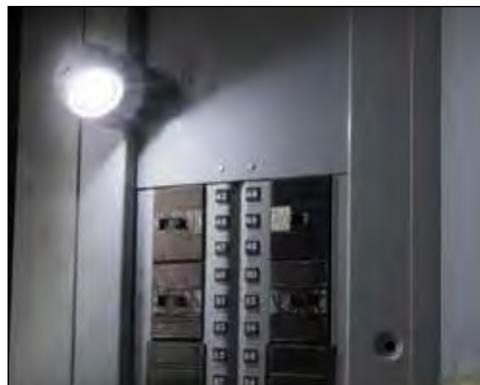

- Display holds 3 pieces - additional pieces included as replenishments.
- Each package contains two EYE Lights.

**Display Dimensions**  
(H) 11" x (W) 6.725" x (D) 12"

**Clamshell Dimensions**  
(H) 10.9" x (W) 4.8" x (D) 3"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932352	6690	NEBO EYE Light	16.99	16 PIECES

# NEBO<sup>®</sup> REBEL<sup>™</sup>

 **RECHARGEABLE**



The REBEL is a fully rechargeable task light that includes an adjustable head strap for use as a head lamp. Small enough to fit in the palm of your hand, this powerful light rebels against its size with its impressive 600 lumen output. This bright light is also equipped with a rotating, removable steel clip and powerful magnetic base to provide even more hands-free lighting options.

- 4 LIGHT MODES**
- **HIGH (240 lumens)** - 2 hours / 56 meters
  - **LOW (60 lumens)** - 4.5 hours / 28 meters
  - **TURBO (600 lumens)** - 40 seconds / 90 meters
  - **STROBE (600 lumens)** - 2 hours / 90 meters

- DESIGN**
- Fully rechargeable
  - Removable steel clip
  - Anodized aircraft-grade aluminum; water and impact-resistant

- OPERATION**
- Top-positioned, ON/OFF button

- ACCESSORIES**
- Adjustable head strap; one size fits all
  - Magnetic USB to Micro USB charging cable with charging indicator included

- BATTERIES**
- Powered by rechargeable battery (included)  
(Recharge time: 1.5 - 2 hours)

- SPECS**
- 0.1875 lbs.
  - (H) 2.85" x (W) 1.2" x (D) 1"



- Display holds 2 pieces in front for testing, additional pieces can be stored in the back as replenishments.
  - Each REBEL<sup>™</sup> comes with a gift box
  - Product attaches securely to the display using the magnetic base.
- Display Dimensions**  
(H) 11.5" x (W) 10.75" x (D) 13.75"
- Gift Box Dimensions**  
(H) 5.25" x (W) 3.25" x (D) 2.45"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932369	6691	REBEL 600 Lumen Task Light / Head Lamp	34.99	12 PIECES

**NEBO®**  
**Flipit400**  
 Bright light right where you need it.

The Flipit400 is a 400 lumen C·O·B LED light that operates like a standard household light switch. You can flip to High Mode for 400 lumens of intense bright light, or flip it halfway for 100 lumens of bright light to extend the battery life. Flipit400 includes hook & loop double-sided tape and 2 magnets for two easy mounting options, as well as a drywall screw hole for permanent mounting.

- 2 LIGHT MODES**
- HIGH (400 lumens) - 5 hours / 28 meters
  - LOW (100 lumens) - 20 hours / 16 meters

- DESIGN**
- Water and impact-resistant plastic design
  - Powerful magnets, double-sided hook and loop tape, and screw hole for mounting




- OPERATION**
- Front-positioned, ON/OFF switch

- BATTERIES**
- Powered by 3 AA batteries (included)

- SPECS**
- 0.35 lbs.
  - Size: (L) 4.5" x (W) 3.15" x (D) 1.25"



A new innovation in LED technology, C·O·B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C·O·B outperforms traditional lighting with more output, less energy consumption and longer LED life span.

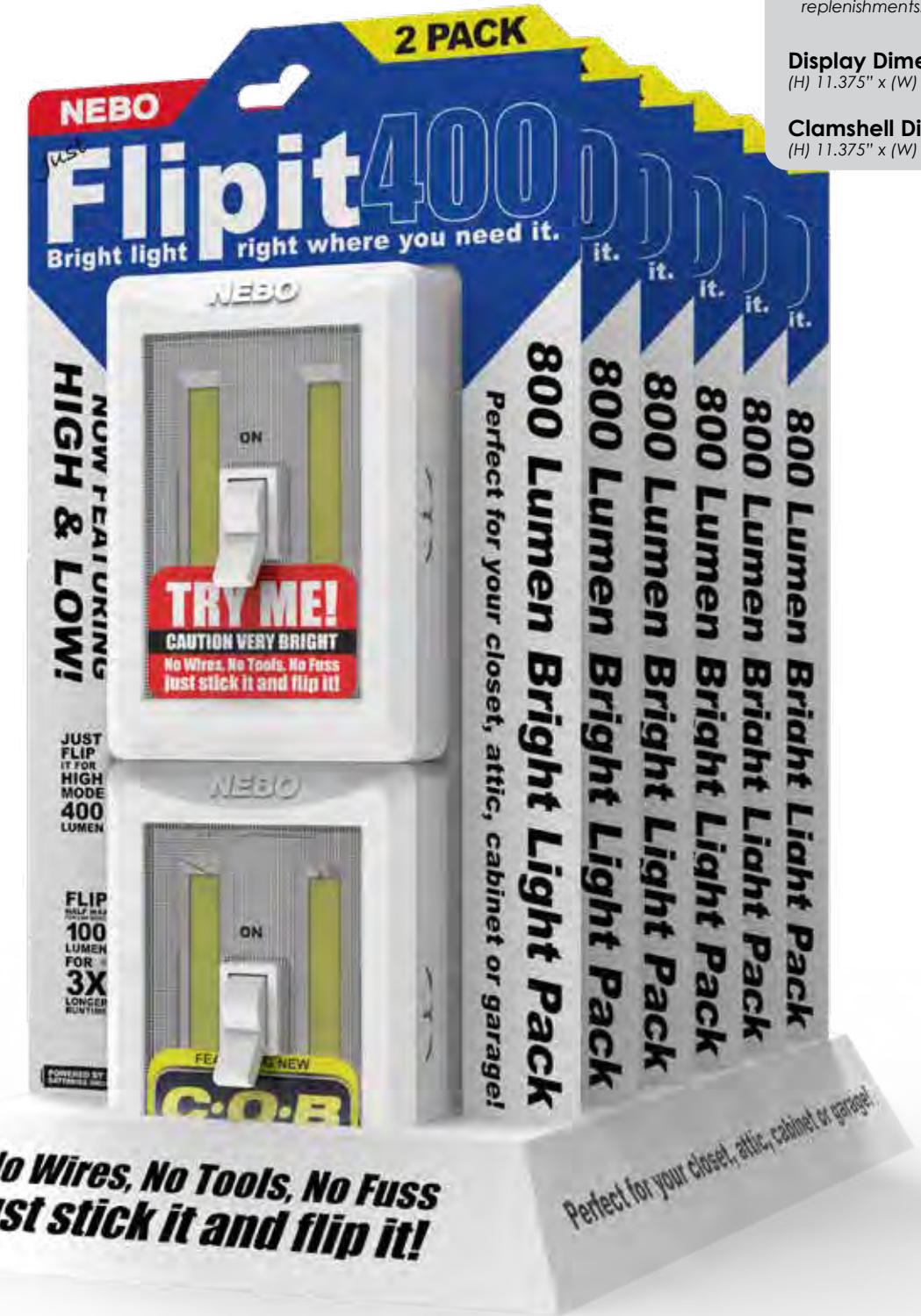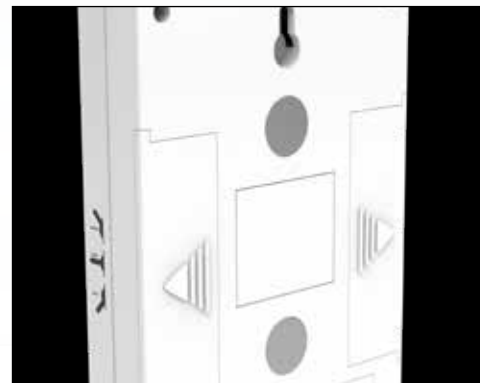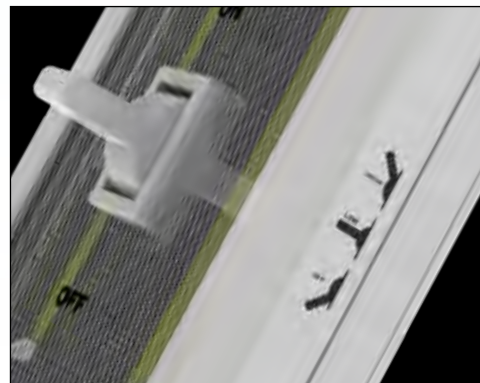

• Display holds 6 clamshell packages, additional pieces included as replenishments.

**Display Dimensions**  
 (H) 11.375" x (W) 7.375" x (D) 11"

**Clamshell Dimensions**  
 (H) 11.375" x (W) 4.75" x (D) 1.25"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932437	6699	Flipit400	16.99	24 PIECES

# NEBO<sup>®</sup> LEO<sup>™</sup>

The LEO<sup>™</sup> is an amazingly versatile pocket light. Fully dimmable and equipped with Memory Power Setting, the LEO's work light and spot light pivot and rotate to direct the light wherever you need it. A pocket clip, magnetic base and a kick stand / hanging hook give the LEO endless options of hands-free lighting.

## 2 LIGHT MODES

- Work Light (220 lumens) - 5 hours / 22 meters
- Spot Light (80 lumens) - 7 hours / 52 meters

### DESIGN

- Rotating directional light
- Non-slip rubber coating
- Water and impact-resistant
- Fully dimmable
- Memory Power Setting
- Pocket clip
- Powerful magnetic base
- Kick stand / hanging hook

### OPERATION

- Top-positioned, ON/OFF button; hold to dim

### BATTERIES

- Powered by 3 AAA batteries (included)

### SPECS

- 0.7 lbs.
- Length: 6.625" / Extended: 9.75"
- Width: 0.75" / Depth: 1.375"



### ASSORTED COLORS



A new innovation in LED technology, C-O-B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C-O-B outperforms traditional lighting with more output, less energy consumption and longer LED life span.



- Display showcases 3 pieces in front - additional pieces can be stored in the back of the display.

- Each LEO<sup>™</sup> comes with a gift box.

### Display Dimensions

(H) 13" x (W) 4.75" x (D) 5.5"

### Gift Box Dimensions

(H) 6.7" x (W) 1.33" x (D) 0.9"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932086	6657	LEO Work Light and Spot Light	14.99	24 PIECES

# NEBO® GLOW™

The NEBO GLOW Light + Handle fits most of the popular 30 oz. tumblers. GLOW not only makes it easier to hold and carry, but gives you the power of light without moving a finger. No more slipping, dripping or tripping in the dark while trying to balance your tumbler when your hands are full. The GLOW fits most standard vehicle cup holders, and perfectly holds your tumbler secure with the rubberized grip ring.

## 3 LIGHT MODES

- Task Light (220 lumens) - 3 hours / 140 meters
- Lantern (130 lumens) - 3 hours / 10 meters
- Task + Lantern (350 lumens) - 2 hours / 140 meters

## DESIGN

- Ergonomic handle for 30 oz. tumbler
- Fully dimmable
- Memory Power Setting
- Direct-to-Lantern feature
- Rubberized non-slip grip
- Water and impact-resistant

## OPERATION

- Top-positioned, ON/OFF button; hold to dim

## BATTERIES

- Powered by 3 AAA batteries (included)

## SPECS

- 0.47 lbs.
- (H) 4.625" x (W) 4.625" x (D) 6.75"

## PATENT PENDING



The GLOW fits a variety of 30 oz. tumblers, including, but not limited to: YETI, RTIC, Glacier Point, Ozark Trail, NEBO, Member's Mark, Mossy Oak & zak!

**ARCUS**  
LED TECHNOLOGY

ARCUS is a new proprietary C-O-B LED technology that shapes light like never before with 250° of intense light coverage for maximum safety.

**C-O-B**  
LED CHIP TECHNOLOGY

A new innovation in LED technology, C-O-B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C-O-B outperforms traditional lighting with more output, less energy consumption and longer LED life span.



- Display holds 1 piece in front - additional pieces can be stored in the back of the display.
- Each GLOW comes with a gift box.

**Display Dimensions**  
(H) 13" x (W) 4.75" x (D) 5.5"

**Gift Box Dimensions**  
(H) 4.825" x (W) 6.7" x (D) 4.75"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932178	6668	GLOW Light + Handle	19.99	8 PIECES

# NEBO® TANGO™



The TANGO features 2 high-power light sources, a 250 lumen spot light and 750 lumen C·O·B work light. The TANGO is fully rechargeable and also serves as a power bank for your USB powered devices. A seven position 180° rotating arm functions as a hanging hook, carry handle, or a kickstand. And best of all, use Turbo Mode to combine the spot light and work light for 1,000 lumens of intense illumination. After all, it takes two to TANGO.

### 3 LIGHT MODES

- Work Light (750 lumens) - 2 hours / 52 meters
- Spot Light (250 lumens) - 5 hours / 22 meters
- TURBO MODE (1000 lumens) - 2 minutes

### DESIGN

- Fully rechargeable
- Power bank for your USB powered devices
- Full dimming
- Memory Power Setting
- Non-slip rubber coating
- Water and impact-resistant
- 180° pivoting base
- Battery charging indicator

### OPERATION

- Rear-positioned, ON/OFF button; hold to dim

### ACCESSORIES

- Micro USB to USB cable and AC adapter included

### BATTERIES

- Powered by rechargeable battery (included)  
(Recharge time: 5 - 6 hours)

### SPECS

- 0.7 lbs.
- (H) 5.875" x (W) 5.875" x (D) 1.75"



A new innovation in LED technology, C·O·B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C·O·B outperforms traditional lighting with more output, less energy consumption and longer LED life span.



• Display holds 3 pieces - additional pieces included as replenishments.

**Display Dimensions**  
(H) 13" x (W) 4.75" x (D) 5.5"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932147	6665	TANGO Work Light & Spot Light	39.99	10 PIECES

# NEBO® BIG CRYKET™

The BIG CRYKET™ is a versatile 3-in-1 LED light, featuring a 300 lumen C·O·B work light, a bright 300 lumen spot light and an intense red light. Its unique swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.

### 3 LIGHT MODES

- Spot Light (300 lumens) - 5 hours / 140 meters
- C·O·B Flood Light (300 lumens) - 5 hours / 20 meters
- Red (30 lumens) - 10 hours / 6 meters

### DESIGN

- Fully dimmable
- Power memory setting
- Direct-to-red feature
- Anodized aircraft-grade aluminum; water and impact-resistant
- 90° swivel head
- Dual-direction steel belt/pocket clip
- Powerful magnetic base
- Rubberized non-slip grip

### OPERATION

- Side-positioned, ON/OFF button

### BATTERIES

- Powered by 3 AA batteries (included)

### SPECS

- 0.5625 lbs.
- (H) 5.4375" x (W) 1.8125"

### PATENT PENDING



A new innovation in LED technology, C·O·B features smaller, easier clustered LED chips that work together as one lighting module. Because of this design, C·O·B outperforms traditional lighting with more output, less energy consumption and longer LED life span.



• Display holds 1 piece in front for consumer testing, additional pieces can be stored in the back as replenishments.

• Each BIG CRYKET™ comes with a gift box

• Product attaches securely to the display using the magnetic base.

### Display Dimensions

(H) 14" x (W) 5.5" x (D) 7.75"


### Gift Box Dimensions

(H) 5.75" x (W) 3.1875" x (D) 2.625"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397932154	6666	BIG CRYKET	29.99	16 PIECES

**NEBO®**  
Contemporary  
**Flipit**  
Bright light where you need it.

The NEBO® Contemporary Flipit is a 240 lumen C·O·B LED light that operates like a standard household light rocker switch. Flipit includes hook & loop double-sided tape and 2 magnets for two easy mounting options, as well as a drywall screw hole for permanent mounting. The Flipit is powered by 3 AAA batteries (included). Each package contains 2 Contemporary Flipit portable LED lights.

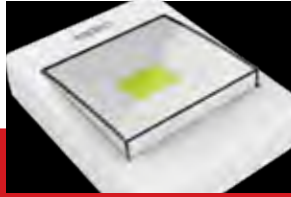

**1 LIGHT MODE**  
• On (240 lumens) - 4 hours / 21 meters



**DESIGN**  
• Water and impact-resistant plastic design  
• Powerful magnets and double-sided hook and loop tape for mounting

**BATTERIES**  
• Powered by 3 AAA batteries (included)



**SPECS**  
• Size: (L) 4.5" x (W) 3" x (D) 0.75"



**Display Dimensions**  
(H) 11.375" x (W) 7.375" x (D) 11"

**Clamshell Dimensions**  
(H) 11.375" x (W) 4.75" x (D) 1.25"



**NEBO®**  
**Flipit**  
Bright light where you need it.

NEBO Flipit is a 215 lumen C·O·B LED that operates like a standard household light switch. No wires, no tools and no fuss! There are 3 ways to attach it: 2 hook and loop tabs, 2 magnets or 2 screw holes (for permanent mounting). Each package contains 2 Flipit portable LED lights.



**1 LIGHT MODE**  
• On (215 lumens) - 3 hours / 21 meters

**DESIGN**  
• Water and impact-resistant plastic design  
• Powerful magnets and double-sided hook and loop tape for mounting

**BATTERIES**  
• Powered by 3 AAA batteries (included)

**SPECS**  
• Size: (L) 4.5" x (W) 3" x (D) 0.75"



**Display Dimensions**  
(H) 11.375" x (W) 7.375" x (D) 11"

**Clamshell Dimensions**  
(H) 11.375" x (W) 4.75" x (D) 1.25"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931539	6558	Contemporary Flipit™ Portable Work Light	14.99	24 PIECES	645397931225	6523	Flipit™ Portable Work Light	14.99	24 PIECES

# NEBO<sup>®</sup> SLYDE<sup>™</sup>+

The SLYDE<sup>™</sup>+ is equipped with programmable memory settings for each light mode, a new C·O·B red light function, a 4x adjustable zoom and instant slide on. And best of all? With all these new great features, the new SLYDE<sup>™</sup>+ is still the same price!



## 4 LIGHT MODES

- Flashlight (300 lumens) - 3 hours / 135 meters
- Work Light (200 lumens) - 3.5 hours / 21 meters
- Red (35 lumens) - 2 hours / 8 meters
- Red Flash (35 lumens) - 9 hours

## DESIGN

- Convex lens
- Tactical edge
- 4x adjustable zoom
- Fully dimmable
- Direct-to-Red Feature (hold button and slide open)
- Memory Power Setting
- Lock-out mode to prevent accidental operation
- Powerful magnetic base
- Anodized aircraft-grade aluminum; weather-proof (IPX4) and impact-resistant

## OPERATION

- Side-positioned, ON/OFF button; hold to dim
- C·O·B Work Light automatically turns ON when opened and OFF when closed

## BATTERIES

- Powered by 4 AAA batteries (included)

## SPECS

- 0.7 lbs.
- Length: Compacted: 7.25" / Extended: 9.5"
- Diameter: (Head) 1.625" / (Barrel) 1.375"

## U.S. PATENT

- D 786,466 S



## Display Dimensions

 
(H) 11.75" x (W) 7.25" x (D) 7.75"

## Gift Box Dimensions


(H) 6.825" x (W) 1.75" x (D) 1.75"



## AVAILABLE COLORS



## AVAILABLE COLORS

 

# NEBO<sup>®</sup> SLYDE<sup>™</sup> KING



With all of the features that you would expect from a SLYDE...and more! The SLYDE<sup>™</sup> KING is equipped with programmable memory settings for each light mode, a new C·O·B red light function, a 4x adjustable zoom and best of all...it's **rechargeable!**

## 4 LIGHT MODES

- Flashlight (330 lumens) - 2 hours / 123 meters
- C·O·B work light (250 lumens) - 4.25 hours / 22 meters
- Red light (40 lumens) - 4.75 hours / 7 meters
- Red flash - 24 hours

## DESIGN

- Fully rechargeable
- Tactical edge
- Convex lens
- 4x adjustable zoom
- Fully dimmable
- Memory Power Setting
- Lock-out mode to prevent accidental operation
- Anodized aircraft-grade aluminum; water and impact-resistant
- Powerful magnetic base
- Battery charging indicator

## OPERATION

- Side-positioned ON/OFF button
- Work light automatically turns ON when opened

## BATTERIES

- Powered by 1 Li-ion rechargeable battery included (3-4 hour recharge time)

## ACCESSORIES

- Micro USB to USB cable included

## SPECS

- 0.8 lbs.
- Length: Compacted: 6.875" / Extended: 9"
- Diameter: (Head) 1.75" / (Barrel) 1.25"

## U.S. PATENT

- D 786,466 S



## Display Dimensions

(H) 11.5" x (W) 7.25" x (D) 7.75"

## Gift Box Dimensions

(H) 7" x (W) 1.875" x (D) 1.875"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931249	6525	SLYDE <sup>™</sup> + with Display	29.99	16 PIECES
645397931935	6618	SLYDE <sup>™</sup> + - Bulk Camo	29.99	8 PIECES

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930884	6434	SLYDE <sup>™</sup> KING with Display	39.99	12 PIECES
645397931973	6643	SLYDE <sup>™</sup> KING - Bulk Camo	39.99	8 PIECES

# NEBO<sup>®</sup> POPLITE

The new NEBO POPLITE is a versatile, compact light and lantern. Its expandable design allows the POPLITE to easily change from flood light, to spot light, to lantern, by sliding the body of the light. Small enough to fit on a key ring, the POPLITE also features a magnetic base and a detachable carabiner clip. To activate the light, just pop the carabiner clip from the light body and the POPLITE is ready to light the way!



### 3 LIGHT MODES

- Spot Light (100 LUX) - 2.5 hours / 40 meters
- Flood Light (20 lumens) - 2.5 hours / 11 meters
- Lantern (20 lumens) - 2.5 hours / 6 meters

### DESIGN

- 8x adjustable zoom
- Anodized aircraft-grade aluminum; water and impact-resistant
- Lantern diffuser
- Carabiner clip
- Powerful magnetic base

### OPERATION

- Pop-on power; just remove carabiner cap

### BATTERIES

- Powered by 3 LR44 batteries (included)

### SPECS

- 0.1 lbs.
- Length: Compacted: 2.52" / Extended: 3.66"
- Diameter: 0.75"



### AVAILABLE COLORS

- Black
- Silver
- Red

Display includes area for testing magnetic base. 'TRY ME' purposes only, not intended for display.

### Display Dimensions

(H) 12" x (W) 7" x (D) 6"

#6557 Color Assortment:  
Black, Silver & Red

Gift Box Dimensions  
(H) 2.625" x (W) 1" x (D) 0.75"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931522	6557	POPLITE Lantern and Flashlight	5.99	48 PIECES

# NEBO<sup>®</sup> POPPY

Poppy is a combination 300 lumen C·O·B LED lantern and bright LED spot light. Poppy is the perfect light for indoor or outdoor use when versatility and powerful lighting are critical. With a rubberized impact-resistant body, Poppy is both rugged and soft to the touch. Poppy easily changes from spot light to lantern with just a slide of its top, revealing a full 360° C·O·B lantern. The handle is designed to easily adjust to conveniently serve both light modes.



### 2 LIGHT MODES

- C·O·B Lantern (300 lumens) - 7.5 hours / 15 meters
- Spot Light (120 lumens) - 18 hours / 120 meters

### DESIGN

- Fully dimmable
- Rubberized body design; water and impact-resistant
- Adjustable handle
- Power memory setting

### OPERATION

- Side-positioned, ON/OFF button

### BATTERIES

- Powered by 3 AA batteries (included)

### SPECS

- 0.3 lbs.
- Height: Closed - 5.46" / Open - 7.79"
- Diameter: 3.58"

### AVAILABLE COLORS

- Red
- Dark Gray
- Yellow
- Green

### Display Dimensions

(H) 13" x (W) 5.5" x (D) 7.75"

#6555 Color Assortment:  
6 of each color

### Gift Box Dimensions

(H) 5.625" x (W) 3.5" x (D) 3.5"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931454	6555	Poppy with Display	16.99	24 PIECES
645397931713	6594	Poppy - Bulk Red	16.99	6 PIECES
645397931720	6595	Poppy - Bulk Dark Gray	16.99	6 PIECES
645397931737	6596	Poppy - Bulk Yellow	16.99	6 PIECES
645397931744	6597	Poppy - Bulk Green	16.99	6 PIECES
645397932031	6651	Poppy Countertop Display	FREE with 12 piece order	1 PIECE

**NEBO**  
**ZBUG™**  
**LANTERN + LIGHT**

The next line of bug defense is Z-Bug Lantern + Light. Equipped with bug-attracting NUV LEDs and a 360° bug-zapping electric grid, this lantern & spot light combo will keep your outdoor excursions enjoyable and bug free! The handle easily adjusts to conveniently serve both light modes. Z-Bug™ Lantern + Light includes Z-Bug Bulb™ Sweeper to remove insect remains from the grid housing.



**1 SPOT LIGHT MODE**  
 • 120 lumens - 18 hours / 120 meters



**3 LANTERN MODES**  
 • White (250 lumens) - 6 hours / 10 meters  
 • White & NUV LEDs - 24 hours  
 • NUV LEDs (395nm) - 40 hours



**DESIGN**  
 • Fully dimmable  
 • 360° insect-zapping rails (1,000 - 1,200V)  
 • 360° protective cover for electric rails  
 • Adjustable handle

**OPERATION**  
 • Side-positioned, ON/OFF button

**ACCESSORIES**  
 • Z-Bug Bulb™ Sweeper for easy cleaning

**BATTERIES**  
 • Powered by 3 AA batteries (included)



**SPECS**  
 • 0.3 lbs.  
 • Height: Closed - 5.46" / Open - 7.79"  
 • Diameter: 3.58"



**Display Dimensions**  
 (H) 13" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
 (H) 4.825" x (W) 3" x (D) 2.325"

**ZBUG BULB™**

For use indoors or outdoors, Z-Bug Bulb™ provides bright white, ambient lighting to any space with its 600 lumen LED. The 4 NUV LEDs emit a 395nm near ultraviolet glow, which mosquitoes and other flying insects find very attractive. Surrounding the NUV LEDs is a 1,000 - 1,200V high-voltage grid that kills the allured insects on contact. Z-Bug Bulb™ includes Z-Bug Bulb™ Sweeper to remove insect remains from the grid housing.



**WHITE LIGHT**  
 600 lumens / 4200K  
 • Replacement for 60W bulbs  
 • 40,000+ hours

**NUV LEDs (395nm)**



**DESIGN**  
 • ABS LED cover  
 • 360° insect-zapping rails (1,000 - 1,200V)  
 • 360° protective cover for electric rails  
 • Standard E27 screw base

**OPERATION**  
 • For use in lamps, wall and ceiling fixtures; just switch light on

**ACCESSORIES**  
 • Z-Bug Bulb™ Sweeper for easy cleaning

**SPECS**  
 • 0.25 lbs.  
 • (H) 6" x (W) 3.125" x (D) 3.125"




**Display Dimensions**  
 (H) 13.2" x (W) 7" x (D) 7.75"

**Gift Tube Dimensions**  
 (H) 7.625" x (W) 3.5" x (D) 3.5"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931706	6587	Z-Bug™ Lantern + Light	24.99	12 PIECES	645397930990	6458	Z-Bug™ Bulb	19.99	16 PIECES

**NEBO®**  
the **Larry BOSS**  
3 IN ONE POWER WORK LIGHT

The Larry® BOSS, the essential 3-in-1 power work light, features a high-power flashlight, work light and red light. Taking charge of keeping your work space clean, the BOSS is equipped with a recessed 13.5" telescopic magnetic grabber, great for picking up lose screws, nails, nuts and bolts. The Larry® BOSS also has a powerful magnetic base for hands-free lighting.

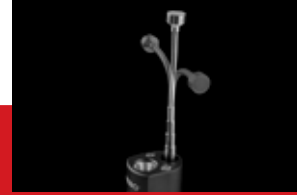

**4 LIGHT MODES**

- Top light (120 lumens) - 12 hours / 44 meters
- Work light (400 lumens) - 4.5 hours / 27 meters
- Red light (40 lumens) - 20 hours / 7 meters
- Red hazard flasher - 40 hours



**DESIGN**

- Fully dimmable
- Anodized aircraft-grade aluminum; water and impact-resistant
- Powerful magnetic base
- 13.5" telescoping magnetic grabber
- Rubberized slide release for magnetic grabber

**OPERATION**

- Front-positioned, ON/OFF button

**BATTERIES**

- Powered by 3 AA batteries (included)

**SPECS**

- 0.8 lbs.
- Length: Compacted: 7.625" / Extended: 22.375"
- Width: 1.1875" / Depth: 1.375"



**Display Dimensions**  
(H) 15.5" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
(H) 7.75" x (W) 1.5625" x (D) 1.325"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930860	6431	Larry® BOSS Power C·O·B Work Light	34.99	12 PIECES

**NEBO®**  
the **BIG Larry PRO**  
POWER WORK LIGHT



The **BRIGHTEST Larry yet...**The BIG Larry® PRO features a high-power, **500 lumen** C·O·B work light and red hazard flasher. **Fully rechargeable** and equipped with 2 magnetic charging stations, the BIG Larry® PRO is ready to handle any task at any time. The PRO also has a powerful magnetic base and adjustable steel clip for convenient hands-free lighting. When there is work to be done...bring a PRO!

**3 LIGHT MODES**

- HIGH (500 lumens) - 4.5 hours / 37 meters
- Red (45 lumens) - 8 hours / 13 meters
- Red hazard flasher - 24 hours / 13 meters

**DESIGN**

- Fully dimmable
- Direct-to-Red
- Anodized aircraft-grade aluminum; water and impact-resistant
- Adjustable clip
- Powerful magnetic base
- Battery charging indicator

**OPERATION**

- Top-positioned, ON/OFF button

**ACCESSORIES**



- Two magnetic charging stations and cables

**BATTERIES**

- Powered by 1 Li-ion rechargeable battery (included)  
(Recharge time: 5 - 6 hours)

**SPECS**

- 0.8 lbs.
- (H) 7.75" x (W) 1.1875" x (D) 1.375"

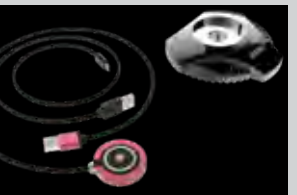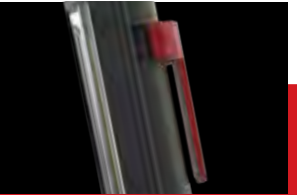

**Display Dimensions**  
(H) 15.5" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**  
(H) 7.75" x (W) 1.5625" x (D) 1.325"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931959	6640	BIG Larry® PRO Power Work Light	34.99	12 PIECES

# NEBO<sup>®</sup> the **BIG Larry**<sup>®</sup> POWER WORK LIGHT

The BIG Larry knows how to light up a room! Equipped with new C·O·B LED technology, the BIG Larry outputs 400 lumens of intense light. Secondary light modes include Low (160 lumens) and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodized aluminum body and recessed LED housing ensures that the BIG Larry can handle any situation.



### 3 LIGHT MODES

- High (400 lumens) - 4.5 hours / 29 meters
- Low (160 lumens) - 15 hours / 17 meters
- Red Flash - 40 hours



### DESIGN

- Anodized aircraft-grade aluminum; water and impact-resistant
- Powerful magnetic base

### OPERATION


- Top-positioned, ON/OFF button

### BATTERIES

- Powered by 3 AA batteries (included)

### SPECS

- 0.45 lbs.
- (H) 7.4375" x (W) 0.875" x (D) 1.125"

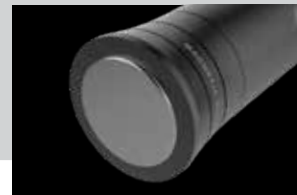

#6393 BIG Larry  
Work Light Holster  
US Patent: D789,778 S

### Display Dimensions

(H) 12" x (W) 5.5" x (D) 7.8125"

 
#6306 Color Assortment:  
4 Silver / 10 Black

### Gift Box Dimensions

(H) 7.5" x (W) 1.25" x (D) 1"



### AVAILABLE COLORS



# NEBO<sup>®</sup> the **LiL Larry**<sup>®</sup> POWER POCKET LIGHT

Don't let the name fool you, LiL Larry<sup>®</sup> packs enough power to take its rightful place in the Larry<sup>®</sup> family. Equipped with a 250 lumen C·O·B work light, LiL Larry features 3 light modes: high, low and emergency red flash. The anodized aluminum body and recessed LED housing ensure that LiL Larry is ready for any task. Flex-Fuel<sup>™</sup> allows the LiL Larry to condense in size and operate with 2 AAA batteries instead of 3 AAA.

### 3 LIGHT MODES

- High (250 lumens) - 3 hours / 29 meters
- Low (95 lumens) - 10 hours / 17 meters
- Red Flash - 10 hours

### DESIGN

- Anodized aircraft-grade aluminum; water and impact-resistant
- Steel clip
- Powerful magnetic base

### OPERATION



- Top-positioned, ON/OFF button

### BATTERIES

- Powered by 3 AAA batteries (included)
- Flex-Fuel allows operation with just 2 AAA

### SPECS

- 0.2 lbs.
- (H) 6.0625" x (W) 0.625" x (D) 1"

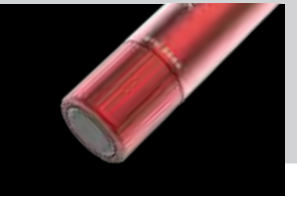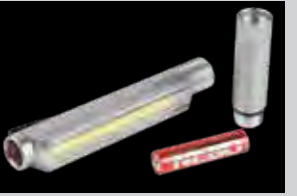

## FLEX-FUEL<sup>™</sup>



### Display Dimensions

(H) 10" x (W) 5.5" x (D) 7.75"

#6373 Color Assortment:  
4 Red, 4 Silver & 10 Black

### Gift Box Dimensions

(H) 6.25" x (W) 1" x (D) 0.75"



### AVAILABLE COLORS



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930365	6306	BIG Larry <sup>®</sup> with Display	24.99	14 PIECES
645397930648	6382	BIG Larry <sup>®</sup> - Bulk Camo	24.99	7 PIECES
645397930679	6384	BIG Larry <sup>®</sup> - Bulk Black	24.99	7 PIECES
645397930686	6385	BIG Larry <sup>®</sup> - Bulk Silver	24.99	7 PIECES
645397930792	6413	BIG Larry <sup>®</sup> - Bulk Red	24.99	7 PIECES
645397931157	6493	BIG Larry <sup>®</sup> - Bulk Patriotic	24.99	7 PIECES
645397930761	6393	BIG Larry <sup>®</sup> Work Light Holster	4.99	7 PIECES


UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930570	6373	LiL Larry <sup>®</sup> with Display	19.99	18 PIECES
645397931027	6463	LiL Larry <sup>®</sup> - Bulk Red	19.99	9 PIECES
645397931034	6464	LiL Larry <sup>®</sup> - Bulk Black	19.99	9 PIECES
645397931041	6465	LiL Larry <sup>®</sup> - Bulk Silver	19.99	9 PIECES
645397931058	6466	LiL Larry <sup>®</sup> - Bulk Camo	19.99	9 PIECES
645397931140	6492	LiL Larry <sup>®</sup> - Bulk Patriotic	19.99	9 PIECES

The Larry<sup>®</sup> and Lucy<sup>®</sup> are now **BRIGHTER THAN EVER!** Now, equipped with new C·O·B LED technology, the Larry<sup>®</sup>C and Lucy<sup>®</sup>C output **170 lumens** of intense light. The rotating magnetic clip gives you convenient hands-free lighting by attaching to virtually anything. The reinforced plastic body design is water and impact-resistant, making this light basically indestructible.



**1 LIGHT MODE**

- 170 lumen C·O·B LED work light
- 5.6 hours / 20 meters

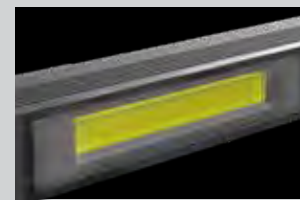

**DESIGN**

- Water and impact-resistant
- Ergonomic non-slip grip
- 180° rotating magnetic clip
- Protective LED housing

**OPERATION**

- Top-positioned, ON/OFF button

**BATTERIES**

- Powered by 3 AAA batteries (included)

**SPECS**

- 0.1870 lbs.
- (H) 6.375" x (W) 0.55" x (D) 1.25"



**Display Dimensions**

(H) 8.75" x (W) 6" x (D) 6"

**#6327 Color Assortment:**

6 Red, 6 Gray, 6 Blue & 6 Yellow

**Gift Box Dimensions**

(H) 6.5" x (W) 1.5" x (D) 0.75"



**AVAILABLE COLORS**



Equipped with a 120 lumen C·O·B LED work light and a 50 lumen flashlight, The Larry<sup>®</sup> TILT is adaptable for any work environment. The TILT provides hands-free lighting in three different ways: a hanging hook, a 200° pivoting stand and a magnetic base. This new design features an **easy-to-activate push button**. Whether you are under the hood, under the sink or just out in the dark, the Larry<sup>®</sup> TILT is the perfect directional pocket work light!

**2 LIGHT MODES**

- Top Light (50 lumens) - 3.5 hours / 27 meters
- Work Light (120 lumens) - 3 hours / 19 meters

**DESIGN**

- Weather-proof (IPX4) and impact-resistant
- Fully dimmable
- Non-slip compact body design
- Steel belt/pocket clip
- 200° pivoting stand
- Collapsible, hanging hook
- Powerful magnetic base

**OPERATION**

- NEW rear-positioned ON/OFF button

**BATTERIES**


- Powered by 2 AAA batteries (included)

**SPECS**

- 0.15 lbs.
- (H) 6.375" x (W) 1" x (D) 0.75"



**ASSORTED COLORS**

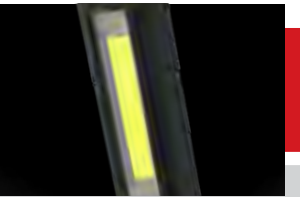

**Display Dimensions**

(H) 15" x (W) 7.5" x (D) 8"

**#6539-B Color Assortment:**

6 of each color

**Gift Box Dimensions**

(H) 6.5" x (W) 1.125" x (D) 0.825"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930402	6327	Larry <sup>®</sup> C with Display	8.99	24 PIECES
645397930464	6350	Larry <sup>®</sup> C - Bulk Red	8.99	12 PIECES
645397930471	6351	Larry <sup>®</sup> C - Bulk Blue	8.99	12 PIECES
645397930488	6352	Larry <sup>®</sup> C - Bulk Gray	8.99	12 PIECES
645397930495	6353	Larry <sup>®</sup> C - Bulk Yellow	8.99	12 PIECES
645397930501	6354	Larry <sup>®</sup> C - Bulk Camo	8.99	12 PIECES
645397930518	6355	Lucy <sup>®</sup> C - Bulk Pink	8.99	12 PIECES

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931300	6539-B	Larry <sup>®</sup> TILT Directional Pocket Work Light	11.99	24 PIECES

The REDLINE® V is a powerful, **500 lumen** flashlight, featuring OC™ optics. The REDLINE® V is **completely waterproof** (IPX7) and is also equipped with a steel clip, powerful magnetic base, 4x zoom and 5 light modes (high, medium, low, defensive strobe & S.O.S.).



**5 LIGHT MODES**

- High (500 lumens) - 2.5 hours / 170 meters
- Medium (200 lumens) - 6 hours / 110 meters
- Low (50 lumens) - 22 hours / 50 meters
- Strobe (500 lumens) - 6 hours
- S.O.S. (500 lumens) - 48 hours



**DESIGN**

- Convex lens
- Tactical edge
- 4x adjustable zoom
- Signature Red Ring®
- Anodized aircraft-grade aluminum; waterproof (IPX7) and impact-resistant
- Steel belt/pocket clip
- Powerful magnetic base

**OPERATION**

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

**BATTERIES**

- Powered by 3 AAA batteries (included)

**SPECS**

- 0.35 lbs.
- Length: Compacted: 5" / Extended: 5.5"
- Diameter: (Head) 1.375" / (Barrel) 1.25"

**U.S. PATENT**

- 659,869 S



**Display Dimensions**  
(H) 12" x (W) 6" x (D) 8.75"

**Gift Box Dimensions**  
(H) 5.15" x (W) 1.5" x (D) 1.5"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931942	6639	REDLINE® V 500 Lumen Flashlight - Gray	24.99	16 PIECES
645397932475	6703	REDLINE® V 500 Lumen Flashlight - Black	24.99	16 PIECES

With **1,400 lumens** of high intensity light, this must-have flashlight can throw a spectacularly bright beam over 260 meters. The BLAST is **completely waterproof** (IPX7) and ready for any weather condition. Want more? How about a 4x zoom and 5 light modes (high, medium, low, defensive strobe & flashing beacon).



**5 LIGHT MODES**

- High (1400 lumens) - 2.5 hours / 260 meters
- Medium (560 lumens) - 7 hours / 180 meters
- Low (140 lumens) - 30 hours / 90 meters
- Strobe (1400 lumens) - 6 hours
- Beacon (200 lumens) - 120 hours

**DESIGN**

- Convex lens
- Tactical edge
- 4x adjustable zoom
- Signature Red Ring®
- Anodized aircraft-grade aluminum; waterproof (IPX7) and impact-resistant

**OPERATION**

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

**ACCESSORIES**

- Lanyard (included)

**BATTERIES**


- Powered by 6 AA batteries (included)

**SPECS**

- 0.95 lbs.
- Length: Compacted: 7.25" / Extended: 7.75"
- Diameter: (Head) 1.875" / (Barrel) 1.375"

**U.S. PATENT**

- 659,869 S

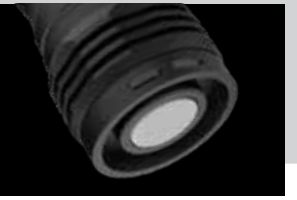

**Display Dimensions**  
(H) 12" x (W) 6" x (D) 8.75"

**Gift Box Dimensions**  
(H) 7" x (W) 2" x (D) 1.95"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931331	6542	REDLINE® BLAST 1400 Lumen Flashlight	39.99	12 PIECES

The REDLINE® RC™ with MagDock features a **MagDock magnetic charging station** that docks and charges your REDLINE®. Small enough to fit in the palm of your hand, the RC™ is fully equipped with all of the features that make the REDLINE® series so popular.



**4 LIGHT MODES**

- High (320 lumens) - 1 hour / 110 meters
- Medium (125 lumens) - 2 hours / 70 meters
- Low (32 lumens) - 9 hours / 35 meters
- Strobe (320 lumens) - 2 hours / 110 meters

**DESIGN**

- 4x adjustable zoom
- Anodized aircraft-grade aluminum; water and impact-resistant
- OC™ Technology
- Convex lens
- Signature Red Ring®
- Steel belt/pocket clip
- Magnetic base
- Protective LED housing
- Battery charging indicator

**OPERATION**

- Side-positioned, ON/OFF button

**ACCESSORIES**

- USB to Micro USB cable included
- Lanyard included

**BATTERIES**

- Internal, rechargeable lithium-ion battery (Recharge time - up to 2 hours)

**SPECS**

- 0.25 lbs.
- Length: Compacted: 3.5625" / Extended: 3.875"
- Diameter: 1.25"

**U.S. PATENT**

- 8,628,210



Don't let the micro size fool you...the Micro REDLINE® OC™ packs enough power to carry the REDLINE® name. This light is small enough to fit in the palm of your hand, but bright enough for any situation. Equipped with OC™ Technology the Micro has a perfectly dispersed beam of light while in flood mode. The Micro REDLINE® OC™...small never shined so big!

**4 LIGHT MODES**

- High (360 LUX) - 6 hours / 76 meters
- Medium (183 LUX) - 12 hours / 54 meters
- Low (39 LUX) - 15 hours / 25 meters
- Strobe (360 LUX) - 12 hours / 76 meters

**DESIGN**

- Anodized aircraft-grade aluminum; water and impact-resistant
- OC™ Technology
- Convex lens
- Signature Red Ring®
- 6x adjustable beam
- Steel belt/pocket clip
- Magnetic base

**OPERATION**

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

**BATTERIES**

- Powered by 1 CR123A battery (included)

**SPECS**

- 0.1 lbs.
- Length: Compacted: 2.625" / Extended: 3.15"
- Diameter: (Head) 0.875" / (Barrel) 0.8125"

**U.S. PATENT**

- 659,869 S



**Display Dimensions**

(H) 11.125" x (W) 5.5" x (D) 7.75"

**Gift Box Dimensions**

(H) 4.2" x (W) 2.95" x (D) 2.35"



**Display Dimensions**


(H) 8" x (W) 6" x (D) 3.875"

**Gift Box Dimensions**

(H) 2.75" x (W) 1.25" x (D) 1.1875"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930754	6392	REDLINE® RC™ with MagDock	39.99	10 PIECES	645397930167	6272-A	Micro REDLINE® OC™ Flashlight	14.99	16 PIECES

This **fully rechargeable** flashlight offers a Smart Select Dial to control the 5 unique light modes, a 4x adjustable beam and a steel clip. The REDLINE Select RC also acts as a **power bank for your USB powered device**.

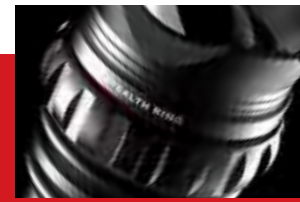

**5 LIGHT MODES**

- High (3100 LUX) - 2.5 hours / 222 meters
- Medium (1550 LUX) - 6 hours / 130 meters
- Low (310 LUX) - 15 hours / 60 meters
- Strobe (3100 LUX) - 8 hours / 222 meters
- Stealth Light (Green Low Light) - 120 hours / 0.9 meters



**DESIGN**

- Fully rechargeable
- Power bank for your USB powered devices
- Anodized aircraft-grade aluminum; water and impact-resistant
- Convex lens
- Signature Red Ring®
- Heat sink design
- Tactical edge
- 4x adjustable beam
- Steel belt/pocket clip
- Anti-roll tactical grip ring
- Magnetic base
- Battery charging indicator



**OPERATION**

- Rear-positioned, glow-in-the-dark ON/OFF button with Smart Select Dial



**ACCESSORIES**

- AC & USB cables included
- Lanyard included

**BATTERIES**

- One 18650 Li-ion rechargeable battery (included)

**SPECS**

- 0.5 lbs.
- Length: Compacted: 6.25" / Extended: 6.75"
- Diameter: (Head) 1.625" / (Barrel) 1.3125"

**U.S. PATENT**

- 659,869 S



**Display Dimensions**

(H) 13.75" x (W) 8.5" x (D) 9"

**Acrylic Box Dimensions**

(H) 9.25" x (W) 3" x (D) 3"



The REDLINE® OC™ outputs 600 LUX of pristine white light. 600 LUX is bright, but what makes the OC™ so special is the OC™ (Optimized Clarity) Technology that creates a perfectly dispersed beam of light while in flood mode.

**2 LIGHT MODES**

- Steady ON (600 LUX) - 2 hours / 92 meters
- Strobe (600 LUX) - 4.5 hours / 92 meters

**DESIGN**

- Anodized aircraft-grade aluminum; water and impact-resistant
- OC™ Technology
- Convex lens
- Signature Red Ring®
- Tactical edge
- 6x adjustable beam
- Dual-direction belt/pocket clip
- Magnetic base

**OPERATION**

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

**ACCESSORIES**

- Lanyard included

**BATTERIES**



- Powered by 1 AA battery (included)

**SPECS**

- 0.25 lbs.
- Length: Compacted: 4.1825" / Extended: 4.75"
- Diameter: (Head) 1.375" / (Barrel) 1"

**U.S. PATENT**

- 659,869 S

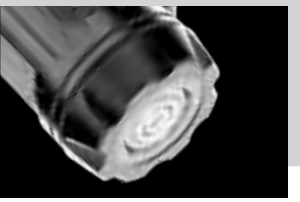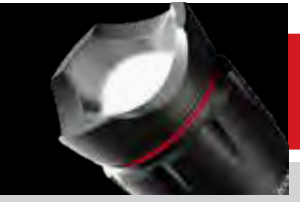

**Display Dimensions**

(H) 8" x (W) 7.5" x (D) 8.25"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930013	6189	REDLINE® Select RC™ Flashlight	69.99	6 PIECES	645397929499	6092	REDLINE® OC™ Flashlight	19.99	16 PIECES

# NEBO® TWYST<sup>z</sup>

The TWYST<sup>z</sup> is a high-power work light, lantern and flashlight, all in one! The TWYST<sup>z</sup> features a 4x adjustable zoom and a powerful magnetic base that provides convenient hands-free lighting. TWYST<sup>z</sup>...shaping light like never before!



### 3 LIGHT MODES

- C-O-B Work Light (75 lumens) - 10 hours / 11 meters
- C-O-B Lantern (200 lumens) - 2 hours / 13 meters
- Flashlight (200 lumens) - 2 hours / 107 meters



### DESIGN

- 4x adjustable zoom
- ARCUS C-O-B LED Technology
- Tactical edge
- Fully dimmable beam
- Anodized aircraft-grade aluminum; water and impact-resistant
- Powerful magnetic base



### OPERATION

- Side-positioned ON/OFF button

### BATTERIES

- Powered by 4 AAA batteries (included)

### SPECS

- 0.55 lbs.
- Length: Compacted: 6.3125" / Extended: 6.75"
- Diameter: (Head) 1.75" / (Barrel) 1"

### U.S. PATENT

- D 774,230 S



### Display Dimensions

(H) 8.5" x (W) 9.25" x (D) 7"

### Gift Box Dimensions

(H) 6.5" x (W) 1.875" x (D) 1.875"



### AVAILABLE COLORS



# NEBO® CRYKET™

The NEBO® CRYKET™ is a versatile 3-in-1 LED light, featuring a 240 lumen C-O-B work light, a bright 250 lumen spot light and an intense red or green light. Its unique swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.



### 3 LIGHT MODES

- Spot Light (250 lumens) - 3.5 hours / 113 meters
- C-O-B Flood Light (240 lumens) - 2.75 hours / 21 meters
- Red (15 lumens) - 6.5 hours / 6 meters
- Green (30 lumens) - 3 hours / 8 meters [#6549 Camo]

### DESIGN

- Fully dimmable
- Anodized aircraft-grade aluminum; water and impact-resistant
- 90° swivel head
- Power memory setting
- Direct-to-red feature
- Steel belt/pocket clip
- Powerful magnetic base
- Rubberized non-slip grip

### OPERATION

- Top-positioned, ON/OFF button

### BATTERIES

- Powered by 4 AAA batteries (included)


 
### SPECS

- 0.3 lbs.
- (H) 4.825" x (W) 1.625"

### PATENT PENDING



### AVAILABLE COLORS

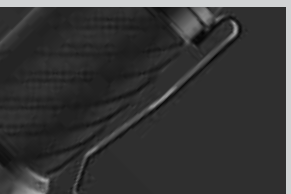

### Display Dimensions

(H) 13" x (W) 5.5" x (D) 7.75"

### Gift Box Dimensions

(H) 4.825" x (W) 3" x (D) 2.325"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930563	6372	TWYST <sup>z</sup> with Display	29.99	16 PIECES
645397930907	6436	TWYST <sup>z</sup> - Bulk Black	29.99	12 PIECES

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930914	6437	CRYKET™ with Display	24.99	16 PIECES
645397931393	6549	CRYKET™ - Bulk Camo	24.99	12 PIECES

# NEBO® WORKBRITE®<sup>2</sup>

The WORKBRITE 2™ adapts to your work environment, making it the handiest of work lights. Equipped with a 200 lumen C·O·B LED work light, the WORKBRITE 2™ also features a 100 lumen flashlight and a rear, emergency red flasher LED. The WORKBRITE 2™ provides hands-free lighting in three different ways: a hanging hook, a 200° pivoting stand and a magnetic base. Whether you are under the hood, under the sink or just out in the dark, the WORKBRITE 2™ works great for any application.



### 3 LIGHT MODES

- Work Light (200 lumens) - 3 hours / 20 meters
- Flashlight (100 lumens) - 8 hours / 47 meters
- Red Flash - 200 hours

### DESIGN

- Water and impact-resistant
- Ergonomic, non-slip grip
- 200° pivoting stand
- Collapsible, hanging hook
- Powerful magnetic base

### OPERATION

- Front-positioned, ON/OFF button
- Emergency Red Flasher LED is independently controlled; press light to activate

### BATTERIES

- Powered by 3 AAA batteries (included)

### SPECS

- 0.35 lbs.
- (H) 8.5" x (W) 2" x (D) 1.5"



### Display Dimensions

(H) 12.75" x (W) 5.5" x (D) 7.75"

### Gift Box Dimensions

(H) 8.5" x (W) 2" x (D) 1.5"



# NEBO® THE RECHARGEABLE WORKBRITE®<sup>2</sup>



Never worry about replacing batteries again, with The **RECHARGEABLE** WORKBRITE 2™. This work light is equipped with a 220 lumen C·O·B LED work light, a 120 lumen flashlight and a rear, emergency red flasher LED. The WORKBRITE 2™ provides hands-free lighting in three different ways: a hanging hook, a 200° pivoting stand and a magnetic base. Whether you are under the hood, under the sink or just out in the dark, the WORKBRITE 2™ works great for any application.

### 3 LIGHT MODES

- Work Light (220 lumens) - 6 hours / 22 meters
- Flashlight (120 lumens) - 8 hours / 52 meters
- Red Flash - 200 hours

### DESIGN

- Fully rechargeable
- Water and impact-resistant
- Ergonomic, non-slip grip
- 200° pivoting stand
- Collapsible, hanging hook
- Powerful magnetic base
- Battery charging indicator

### OPERATION

- Front-positioned, ON/OFF button
- Emergency Red Flasher LED is independently controlled; press light to activate

### ACCESSORIES

- 16.5" USB to Micro USB cable included

### BATTERIES

- Powered by 1 18650 Li-ion Rechargeable Battery
- Recharge time: 4-5 hours (AC) / 6-7 hours (USB)

### SPECS

- 0.35 lbs.
- (H) 8.5" x (W) 2" x (D) 1.5"



### Display Dimensions

(H) 13.25" x (W) 5.5" x (D) 7.75"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930341	6304	WORKBRITE 2™ C·O·B LED Work Light	19.99	12 PIECES	645397930358	6305	The Rechargeable WORKBRITE 2™	29.99	12 PIECES

# CaseBrite™

Designed for iPhone 6/6S, 6/6S Plus, 7/8 & 7/8 Plus



The NEBO® CaseBrite™ offers more than just protection for your mobile device. The CaseBrite™ features a high-power, 200 lumen C-O-B flashlight that is up to 12x brighter than a standard smart phone light. Designed specifically to not draw from your phone's battery, each CaseBrite™ is independently powered by an internal, rechargeable lithium-ion battery.



### 3 LIGHT MODES

- High (200 lumens) - 3 hours / 30 meters
- Low (20 lumens) - 24 hours
- Strobe (200 lumens) - 7 hours



### DESIGN

- Impact-resistant, non-slip rubber case
- Screen protection lip
- Fully dimmable
- Slim 15mm profile
- Battery life indicator
- Fits iPhone 6/6S, 6/6S Plus, 7 & 7 Plus



### OPERATION

- Rear-positioned, ON/OFF button

### ACCESSORIES

- USB to Micro USB charging cable (included)

### BATTERIES

 
- Internal, rechargeable lithium-ion battery (Recharge time - up to 3 hours)

### SPECS

- 0.2 lbs.
- 6/6S - (H) 5.5" x (W) 2.75" x (D) 0.6"
- 6/6S Plus - (H) 6.3125" x (W) 3.125" x (D) 0.6"



### AVAILABLE COLORS



### #6349 Display Dimensions

(H) 12.5" x (W) 10" x (D) 9.25"

### Box Dimensions (6/6S/7/8)

(H) 6.75" x (W) 4.375" x (D) 1"

### Box Dimensions (6, 6S & 7/8 Plus)

(H) 7.5" x (W) 4.375" x (D) 1"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930433	6347	CaseBrite™ iPhone 6/6S - Black	39.99	4 PIECES
645397930440	6348	CaseBrite™ iPhone 6/6S Plus - Black	39.99	4 PIECES
645397930693	6386	CaseBrite™ iPhone 6/6S - White	39.99	4 PIECES
645397930709	6387	CaseBrite™ iPhone 6/6S Plus - White	39.99	4 PIECES
645397931997	6647	CaseBrite™ iPhone 7 - Black	39.99	4 PIECES
645397932000	6648	CaseBrite™ iPhone 7 Plus - Black	39.99	4 PIECES
645397932017	6649	CaseBrite™ iPhone 7 - White	39.99	4 PIECES
645397932024	6650	CaseBrite™ iPhone 7 Plus - White	39.99	4 PIECES
645397930457	6349	CaseBrite™ Countertop Display	FREE with 12 piece order	1 PIECE

# CaseBrite™

Designed for Samsung Galaxy S7



The NEBO® CaseBrite™ offers more than just protection for your mobile device. The CaseBrite™ features a high-power, 200 lumen C-O-B flashlight that is up to **400% brighter than a standard smart phone light**. Designed specifically to not draw from your phone's battery, each CaseBrite™ is independently powered by an internal, rechargeable lithium-ion battery.



### 3 LIGHT MODES

- 100% (200 lumens) - 2.25 hours
- 10% (20 lumens) - 20 hours
- Strobe (200 lumens) - 6 hours

### DESIGN

- Impact-resistant, non-slip rubber case
- Screen protection lip
- Fully dimmable
- Slim 15mm profile
- Battery life indicator
- Fits Samsung Galaxy S7

### OPERATION

- Rear-positioned, ON/OFF button

### ACCESSORIES

 
- USB to Micro USB charging cable (included)

### BATTERIES

- Internal, rechargeable lithium-ion battery (Recharge time - up to 3 hours)

### SPECS

- 0.2 lbs.
- Galaxy S7 - (H) 5.75" x (W) 2.875" x (D) 0.59"



### Display Dimensions

(H) 12.5" x (W) 10" x (D) 9.25"

### #6513 Box Dimensions

(H) 7.5" x (W) 4.375" x (D) 1"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931201	6513	CaseBrite™ Samsung Galaxy S7	39.99	4 PIECES
645397930457	6349	CaseBrite™ Countertop Display	FREE with 12 piece order	1 PIECE

# NEBO® DUO 250+ LUMEN HEAD LAMP

The NEBO® DUO Head Lamp is an all-powerful, hands-free lighting solution. The push button on/off button allows you to easily cycle through the FOUR light modes: one white LED (250 Lumens), 2 C•O•B strips (80 Lumens) or 2 RED C•O•B strips in steady or beacon mode. The red LED is a low-signature light, which ensures stealth in the dark, enhances night vision and makes reading in little to no light possible. Its signature 2 strip C•O•B design fully illuminates your immediate area with its wide flood beam. The DUO Head Lamp is tough, reliable, lightweight and completely shock-proof.



### 4 LIGHT MODES

- Spot Light (250 lumens) - 3.5 hours / 122 meters
- C•O•B Flood Light (80 lumens) - 7 hours / 13 meters
- Red C•O•B (10 lumens) - 8 hours / 4 meters
- Red Beacon - 48 hours / visible over 1 mile

### DESIGN

- Fully dimmable
- Water and impact-resistant durable housing
- 90° tilt
- Power memory setting
- Direct-to-red feature

### OPERATION

- Top-positioned, ON/OFF button

### ACCESSORIES

- Dual adjustable head strap; one size fits all

### BATTERIES

- Powered by 3 AAA batteries (included)

### SPECS

- 0.2 lbs.



**Display Dimensions**  
(H) 12.5" x (W) 6.625" x (D) 10"

**Clamshell Dimensions**  
(H) 6.125" x (W) 5.25" x (D) 3"

# NEBO® 90 LUMEN HEAD LAMP

The NEBO® 90 Lumen Head Lamp is a powerful and convenient hands-free lighting solution. The head tilts 90° to direct light exactly where you need it and the adjustable strap provides a sure fit for any size.

### 3 LIGHT MODES

- White (90 lumens) - 9 hours / 100 meters
- Red (8 lumens) - 150 hours / 3 meters
- Red Flash (8 lumens) - 250 hours / 3 meters

### DESIGN

- Reinforced plastic; water and impact-resistant
- 90° tilt
- Adjustable head strap

### OPERATION

- Top-positioned ON/OFF button

### BATTERIES

- Powered by 3 AAA batteries (included)

### SPECS

- 0.225 lbs.
- One size fits all; adjustable fit



**Clamshell Dimensions**  
(H) 7.25" x (W) 4.45" x (D) 2.875"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930983	6444	DUO 250+ Lumen Headlamp	24.99	12 PIECES	645397929215	6003	90 Lumen Head Lamp	16.99	6 PIECES

# NEBO® LUMO®

Compact, handy and bright...the LUMO® Clip Light is the perfect "whatever you need it to be" light. Key chain light, purse light, backpack light, book light...the possibilities are endless. This compact 25 lumen light comes with a carabiner attachment to clip anywhere you need. The white top of the LUMO® is a diffuser dome that helps spread the light evenly to create a more omnidirectional light source. LUMO® Clip Light... the brilliant clip light!



### 1 LIGHT MODE

• 25 lumens - 5 hours / 3 meters

#### DESIGN

- Anodized aircraft-grade aluminum, water and impact-resistant
- Carabiner clip
- Glow-in-the-dark button
- Diffuser dome softens the light

#### OPERATION

- Rear-positioned glow-in-the-dark ON/OFF button

#### BATTERIES

- Powered by 3 LR44 batteries (included)

#### SPECS

- 0.2 lbs.
- (L) 3.625" x (W) 0.75"



#### AVAILABLE COLORS



#### AVAILABLE COLORS



#### Display Dimensions

(H) 9" x (W) 6.5" x (D) 6.5"

#6095 Color Assortment:  
12 of each color

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397929529	6095	LUMO® 25 Lumen Clip Light	5.99	48 PIECES
645397929864	6157	LUMO® 25 Lumen Clip Light - Bulk Red	5.99	12 PIECES
645397929871	6158	LUMO® 25 Lumen Clip Light - Bulk Silver	5.99	12 PIECES
645397929888	6159	LUMO® 25 Lumen Clip Light - Bulk Blue	5.99	12 PIECES
645397929895	6160	LUMO® 25 Lumen Clip Light - Bulk Black	5.99	12 PIECES

# NEBO® LUMORE™

Introducing the latest in ultimate versatile lighting...the LUMORE™. This brilliant clip light features a 25 lumen LED. Surrounding the LED is a dome, which doubles the features of the light output. The dome acts as a diffuser to create ambient light, while a small hole allows light to shine through for standard flashlight use. The LUMORE™ is equipped with a flat base and a rotating clip to provide convenient hands-free lighting in two different ways.

### 3 LIGHT MODES

- High (25 lumens) - 1 hour / 9 meters
- Low (10 lumens) - 3.5 hours / 6 meters
- Strobe - 4.5 hours / 9 meters



#### DESIGN

- Anodized aircraft-grade aluminum; water and impact-resistant
- Carabiner clip
- Glow-in-the-dark button
- Diffuser dome

#### OPERATION

- Rear-positioned ON/OFF button

#### BATTERIES

- Powered by 3 LR44 batteries (included)

#### SPECS

- 0.2 lbs.
- (H) 3.625" x (W) 0.75"



#### Display Dimensions

(H) 9" x (W) 6.5" x (D) 6.5"

#6329 Color Assortment:  
12 of each color

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930426	6329	LUMORE™ Dome Light and Flashlight	5.99	48 PIECES
645397930525	6357	LUMORE™ - Bulk White	5.99	12 PIECES
645397930532	6358	LUMORE™ - Bulk Red	5.99	12 PIECES
645397930549	6359	LUMORE™ - Bulk Blue	5.99	12 PIECES
645397930556	6360	LUMORE™ - Bulk Green	5.99	12 PIECES

# NEBO® TWIN PUCKS

Twin Pucks features a task light and an emergency beacon all-in-one. Both lights attach magnetically to each other, but can also operate independently and are separately powered. The task light provides hands-free lighting in three different ways: 180° adjustable stand, hanging hole or the magnetic base. The emergency beacon works perfectly for roadside hazard lighting, and each puck has a magnet to adhere to metal surfaces...**PERFECT FOR ANY CAR!**



### 3 LIGHT MODES - WHITE LIGHT

- High (160 lumens) - 10 hours / 24 meters
- Medium (80 lumens) - 20 hours / 16 meters
- Low (10 lumens) - 48 hours / 7 meters



### 5 LIGHT MODES - RED LIGHT

- Rotate Flash - 38 hours / 1.6 KM
- 8 LEDs Steady ON - 7.5 hours / 1.6 KM
- 8 LEDs Flash - 27 hours / 1.6 KM
- 8 LEDs S.O.S. - 7.5 hours / 1.6 KM
- 4 LEDs Steady ON - 17.5 hours / 1.6 KM

#### DESIGN

- Water and impact-resistant
- Hanging hole
- 180° adjustable stand
- Rubber grips
- Task light and emergency beacon connect magnetically

#### OPERATION

- Dual buttons for task light and emergency beacon

#### BATTERIES

- C-O-B LED powered by 3 AAA batteries (included)
- 8 red LEDs powered by 2 AAA batteries (included)

#### SPECS

- 0.46 lbs.
- Diameter: 3.36"



#### Display Dimensions

(H) 12" x (W) 5.875" x (D) 10.125"

#### Clamshell Dimensions

(H) 8.25" x (W) 5" x (D) 0.875"

# NEBO® TEMPRA™

Not just for the professional, the TEMPRA™ can help save time and money at work, around the house or in the car. Use the laser-guided infrared thermometer to make sure your car engine is firing on all cylinders. Check your HVAC to ensure your home is cooling and heating efficiently. The TEMPRA™, just one more way NEBO® helps get the job done.



### 2 LIGHT MODES

- High (1340 LUX/130 lumens) - 3.5 hours / 146 meters
- Low (650 LUX/65 lumens) - 7 hours / 102 meters

#### DESIGN

- 4x adjustable zoom
- Infrared lens
- Red laser guide for accurate temperature reading
- Backlit LCD
- Adjustable emissivity for different surface materials
- Fahrenheit/Celsius conversion
- Ergonomic handle
- Low battery indicator
- Data hold function

#### TEMPERATURE RANGE

- -4°F - 716°F (-20°C - 380°C)

#### OPERATION

- Back-positioned ON/OFF button for spot light
- Trigger for laser and temperature scan

#### BATTERIES

- Powered by 4 AA batteries (included)

#### SPECS

- 0.7 lbs.
- (H) 7.625" x (W) 2" x (D) 4.25"



#### Display Dimensions

(H) 13.2" x (W) 7" x (D) 7.75"

#### Gift Box Dimensions

(H) 9.3" x (W) 5.55" x (D) 2.25"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930747	6391	Twin Pucks Task Light & Emergency Beacon	19.99	12 PIECES	645397930877	6433	TEMPRA™ IR Surface Thermometer & Light	49.99	8 PIECES

# NEBO® TRANSPORT™



The TRANSPORT™ is a compact, **rechargeable** flashlight that provides powerful bright light at your fingertips! The TRANSPORT™ is compatible with any DC 12V socket. Just plug directly into your car, truck, boat or any other 12V outlet. Ideal for travel, the TRANSPORT™ conveniently fits in your pocket, purse or briefcase.



**1 LIGHT MODE**  
• ON (125 lumens) - 1 hour / 90 meters

- LIGHT**
- High-power 125 lumen LED
- DESIGN**
- Fully rechargeable
  - Fits any 12V outlet (car cigarette lighter)
  - Anodized aircraft-grade aluminum; water and impact-resistant
  - Battery charging indicator
- OPERATION**
- Top-positioned ON/OFF dial; twist to activate
- BATTERIES**
- Powered by 1 16340 Lithium Ion rechargeable battery (included)
- SPECS**
- 0.15 lbs.
  - (L) 3.6875" x (W) 0.875"



**Display Dimensions**  
(H) 7.25" x (W) 7.625" x (D) 6.25"  
**#6311 Color Assortment:**  
6 Silver / 12 Black



**AVAILABLE COLORS**  
Silver Black


# NEBO® BENDBRITE™

The BENDBRITE™ Hands-Free Flex-Light is a unique and innovative source of no-hassle lighting, perfect for any situation. The BENDBRITE™ is equipped with a magnetic clip base, giving it the ability to attach to virtually any surface. BENDBRITE™, bright light right where you need it!



**2 LIGHT MODES**  
• White (9 lumens) - 7 hours / 10 meters  
• Red (0.4 lumens) - 6.5 hours / 5 meters

- DESIGN**
- BEND-RITE™ flex neck for omnidirectional lighting
  - Reinforced plastic; water and impact-resistant
  - Magnetic clip base
- OPERATION**
- ON/OFF button
- BATTERIES**
- Powered by 2 CR2032 batteries (included)
- SPECS**
- 0.237 lbs.
  - Length: 9.5"

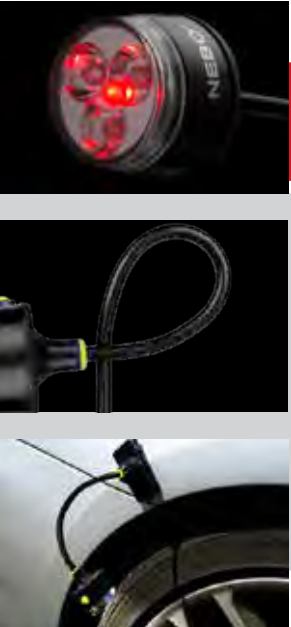

**Display Dimensions**  
(H) 8" x (W) 13" x (D) 7.75"




UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397930396	6311	TRANSPORT™ with Display	19.99	18 PIECES
645397931065	6467	TRANSPORT™ - Bulk Black	19.99	6 PIECES
645397931072	6468	TRANSPORT™ - Bulk Silver	19.99	6 PIECES

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397900306	5423	BENDBRITE™ Hands-Free Flex Light	9.99	16 PIECES

# NEBO® EDGE

Some of the first tactical flashlights in the NEBO® line up, the EDGE series. Equipped with tactical edges, rear-positioned ON/OFF buttons and strong, compact body designs, the EDGE™ series is all that you need in a tactical flashlight.

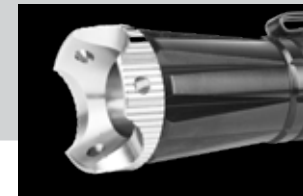

### #5519 EDGE 50™

- High-power 50 lumen LED
- Anodized aircraft-grade aluminum; water and impact-resistant
- Tactical edge
- Steel belt/pocket clip
- Rear-positioned ON/OFF button
- Powered by 1 AA battery (included)

### #5872 EDGE 90™

- High-power 90 lumen LED with Defensive Strobe
- Anodized aircraft-grade aluminum; water and impact-resistant
- Removable tactical edge
- Steel belt/pocket clip
- Rear-positioned ON/OFF button
- Powered by 1 AA battery (included)

### #6085 EDGE 200™

- High-power 200 lumen LED with Defensive Strobe
- Anodized aircraft-grade aluminum; water and impact-resistant
- Removable tactical edge
- Dual-direction steel belt/pocket clip
- Rear-positioned ON/OFF button
- Powered by 1 AA battery (included)

### SPECS

- (#5519/#5872) 0.179 lbs. / (#6085) 0.2lbs.
- (#5519/#5872) 3.75" x 0.75" / (#6085) 4.56" x 0.875"



**#5519/#5872 Display Dimensions**  
(H) 7" x (W) 7" x (D) 5.375"

**#5519 Color Assortment:** 12 gray / 12 black

**#6085 Display Dimensions**  
(H) 8" x (W) 7.5" x (D) 8.25"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397900702	5519	EDGE™ 50 Lumen Flashlight	9.99	24 PIECES
645397107125	5872	EDGE™ 90 Lumen Flashlight	12.99	24 PIECES
645397929475	6085	EDGE™ 200 Lumen Flashlight	15.99	20 PIECES

# NEBO® ZOOM™ 370 LUX LED Flashlight

Let's admit it, everyone has that cheap-o plastic flashlight in the drawer that barely holds a candle to...well, a candle. Here's to the new and more reliable solution for your flashlight drawer...the NEBO® ZOOM™.



### ASSORTED COLORS



### 1 LIGHT MODE

• 370 LUX - 8 hours / 80 meters

### DESIGN

- Water and impact-resistant
- 4x adjustable zoom

### OPERATION

- Rear-positioned ON/OFF button

### BATTERIES

- Powered by 3 AAA batteries (included)

### ACCESSORIES

- Lanyard included

### SPECS

- 0.2 lbs.
- Length: 4.75"
- Diameter: (Head) 1.375" / (Barrel) 1"



**Display Dimensions**  
(H) 7" x (W) 7" x (D) 5.375"

**Color Assortment:**  
4 of each color

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397058120	5947	ZOOM™ 370 LUX Flashlight	11.99	16 PIECES

# 14-in-1 Ultra™ Socket

The NEBO® 14-in-1 Ultra™ Socket comes with 7 screwdriver bits and 5 sockets conveniently stored inside the handle. The head of the Ultra™ Socket tilts a full 180° and locks at 0°, 45°, and 90°, working perfectly as a nut driver for those hard to reach places. The handle is ergonomically designed to add comfort and grip to improve performance. The Ultra™ Socket features a reversible ratchet mechanism making it easier to loosen or tighten any bolt. The 14-in-1 Ultra™ Socket meets and exceeds ANSI standards and is created to withstand more than the normal wear and tear.



**DESIGN**

- Head tilts and locks at 0°, 45° & 90°
- Reversible ratchet mechanism
- Water and impact-resistant
- Ergonomic reinforced plastic handle
- Socket adapter
- Sockets and bits stored inside handle

**SPECS**


- 0.75 lbs.
- (L) 8.25" x (W) 1.5"

**SOCKETS**

- SAE: 1/4", 9/32", 5/16", 11/32", 3/8" & Socket adapter

**BITS**

- Phillips: P1-P3
- Slotted: 3/16" & 1/4"
- Torx: T15 & T20

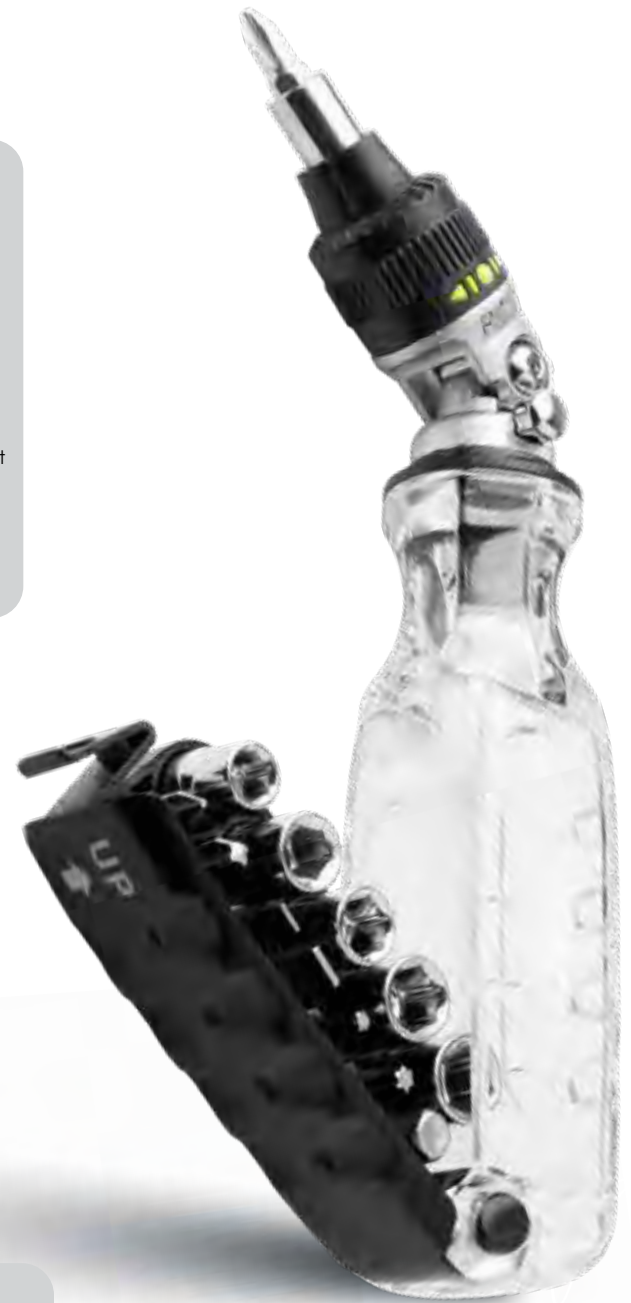

**Display Dimensions**  
(H) 14.75" x (W) 9.125" x (D) 6"

# Ultra™ Socket Combination Kit

The NEBO® Ultra™ Socket Combination Kit comes with 19 sockets conveniently stored in SAE and Metric trays. The head of the Ultra™ Socket tilts and locks at 0°, 45°, and 90°, working perfectly as a nut driver for those hard to reach places. The Ultra™ Socket features a reversible ratchet mechanism making it easier to loosen or tighten any bolt and an ergonomic rubber handle to add comfort and grip.



**DESIGN**

- Head tilts and locks at 0°, 45° & 90°
- Reversible ratchet mechanism
- Water and impact-resistant
- Ergonomic rubber handle
- Magnetic 1/4" bit holder
- Screwdriver bits stored inside handle

**SPECS**

- 1.6 lbs.
- (L) 8" x (W) 1.375"

**SOCKETS**

- Metric: 5mm, 6mm, 7mm, 8mm, 9mm, 10mm, 11mm, 12mm, 13mm
- SAE: 3/16", 1/4", 9/32", 5/16", 11/32", 3/8", 7/16", 15/32", 1/2", 9/16"

**BITS**

- Phillips: P1-P3
- Slotted: 1/8", 3/16", 1/4"
- Hex: 1/8", 5/32", 7/32"
- Torx: T15, T20 & T25

**ACCESSORIES**

- 600D Polyester carrying pouch

**U.S. PATENT**

- 6,634,262 & 6,450,067



**Box Dimensions**  
(H) 8.5" x (W) 3.5" x (D) 1.75"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397610113	5606	Ultra™ 14-in-1 Socket and Screwdriver	16.99	12 PIECES	645397130406	4327	Ultra™ Socket Combination Kit	24.99	12 PIECES

# NEBO® Folding LOCK-BLADE Utility Knife

The Folding Lock-Blade Utility Knife uses a quick change feature making it easier to change the blade without any tools. The utility knife accepts all standard utility blades and incorporates a blade lock system which makes this a safe, strong and secure knife that can be unlocked with one hand.




### DESIGN

- Anodized aluminum handle with rubber grip
- Quick change blade feature; no tools required
- Thumb studs for one-handed opening
- Carabiner
- Lock release button to unfold

### SPECS

- 0.5 lbs.
- Length: (Open) 8" / (Closed) 4.25"
- (W) 1.5" x (D) 0.75"

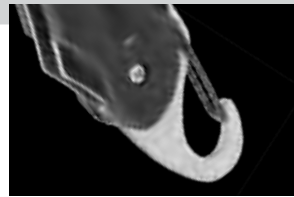

### ASSORTED COLORS



**Display Dimensions**  
(H) 8.75" x (W) 14" x (D) 10.5"

**Clamshell Dimensions**  
(H) 8.25" x (W) 4.25" x (D) 1.25"

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397900504	5517	Folding Lock-Blade Utility Knife Assorted	6.99	18 PIECES

# NEBO® Flashlight Holsters

Each NEBO® flashlight holster has a pouch made to securely fit an assortment of NEBO flashlights and most other brands as well. The holsters are designed for protection, durability and structural strength.



Works with:  
#5077  
#5557  
#5581  
#5599  
#5610  
#5633  
#5947  
#6311  
#6372  
#6436

**#5089 CSI Flashlight Holster**  
Leather covered steel belt/pocket clip, carabiner clip, reinforced holster backing



Works with:  
#5077  
#5557  
#5581  
#5599  
#5610  
#5633  
#6311

**#5922 Leather Flashlight Holster**  
Snap cover with hook and loop closure, steel belt/pocket clip



Works with:  
#5077  
#5112  
#5557  
#5581  
#5599  
#5604  
#5614  
#5610  
#5633  
#5947  
#6311

**#5958 Flashlight Holster**  
Snap cover, steel belt/pocket clip




Works with:  
#5077  
#5557  
#5581  
#5599  
#5610  
#5620  
#5947  
#5955  
#5633

**#6032 Flashlight Holster**  
Designed specifically for #5620/#5955 REDLINE Select, hook and loop closure, belt loop



Works with:  
#5947  
#6156  
#6383  
#6525  
#6618

**#6274 Flashlight Holster**  
Designed specifically for #6156/#6383 SLYDE™ & #6525/#6618 SLYDE™+, steel belt/pocket clip

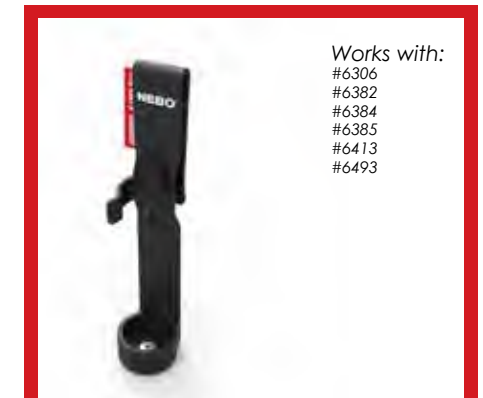

Works with:  
#6306  
#6382  
#6384  
#6385  
#6413  
#6493

**#6393 BIG Larry Flashlight Holster**  
Designed specifically for BIG Larry, belt/pocket clip, magnetic base and flashlight clip



Works with:  
#6156  
#6372  
#6383  
#6434  
#6436  
#6525  
#6542  
#6618

**#6561 Flashlight Holster**  
Hook and loop / snap closure, snap belt loop

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397850892	5089	CSI Flashlight Holster	3.99	10 PIECES
645397035121	5922	Leather Flashlight Holster	16.99	6 PIECES
645397069126	5958	Flashlight Holster	6.99	10 PIECES
645397929284	6032	Flashlight Holster	6.99	10 PIECES
645397930181	6274	Flashlight Holster	6.99	16 PIECES
645397930761	6393	BIG Larry Flashlight Holster	4.99	7 PIECES
645397931560	6561	Flashlight Holster	6.99	16 PIECES

True Utility is a British design and manufacturing company that creates clever and original products that belong in people's pockets, giving them minimalistic, practical solutions to everyday problems.

TU265

**FireLite**

- Bright twist ON/OFF key ring light
  - Hidden fire stash
  - Refillable with lighter fluid
  - Three LR44 batteries included
- MSRP: \$11.99



TU206

**FishFace**

- Multi-functional micro multi-tool
  - 6 screwdrivers, 4 wrenches, 1/4" hex drive, pry bar, file, bicycle spoke wrench, nail cleaner, bottle opener, box opener and a flight safe cutter
  - Black titanium coated stainless steel
- MSRP: \$11.99



TU207

**CardSmart**

- Credit card sized multi tool
  - 30 tools in 1: 4 screwdrivers, 20+ wrenches, 1/4" hex drive, bicycle spoke wrench, pry bar, can opener, bottle opener, rulers, protractor and lanyard attachment
  - Black titanium coated stainless steel
- MSRP: \$9.99



TU210

**CYCLE-ON**

- 30 tools in 1
  - Magnetic bit driver, 6 bits, 12 wrenches, tire levers, screwdrivers, wire cutter/stripper/crimper, rulers, bottle opener, file, extending torque handles
  - Leather carry pouch
  - Black titanium coated 420 grade stainless steel
- MSRP: \$29.99



TU251

**CashStash+**

- Emergency cash capsule for your key ring
  - Waterproof neoprene 'O' ring
  - Fits one note - any currency
  - Aircraft-grade aluminum
- MSRP: \$7.99



TU579S

**Clipster**

- Stainless steel folding knife
  - Handle doubles as money or belt clip
- MSRP: \$14.99



TU208

**Minimalist**

- Bottle opener, file, wire cutter, screwdrivers and non-locking blade
  - Black titanium coated stainless steel
- MSRP: \$11.99



See the full line of pocket tools, knives, flashlights, lighters and accessories in our latest True Utility<sup>®</sup> catalog.

For additional information, catalog requests, or to place an order, please contact your NEBO sales manager.

CALL TOLL FREE: 800-255-6061 or VISIT OUR WEBSITE: [WWW.TRUEUTILITY.COM/US](http://WWW.TRUEUTILITY.COM/US)

True Utility<sup>®</sup>, 3025 N. Great Southwest Parkway, Grand Prairie, TX 75050





# iPROTEC®

iPROTEC® branded gun lights, lasers, scopes and accessories are built to the most rigid specifications and featuring the latest in firearm technology. Designed for home security, hunting and the gun enthusiasts alike, we provide the peace of mind that comes with reliability, performance and value.

All iPROTEC® products are compact, easy to handle and lightweight, so they won't interfere with the balance and design of the firearm. Expertly designed and meticulously crafted, iPROTEC® lights are powered by long-lasting lithium batteries and advanced circuitry to maximize life. With every iPROTEC® product, you have our assurance of quality and craftsmanship that match the same standard you expect from your firearms and gear.

Ever-changing and never compromising, we carefully take our products through the entire process - from concept, to manufacturing, to the end consumer. Our greatest reward is the satisfaction of millions of consumers who continue to buy and love iPROTEC® products.

See the full line of Long Gun Lights, Rail-Mount Lights, Scopes, Flashlights & Accessories in our latest iPROTEC® catalog.



For additional information, catalog requests, or to place an order, please contact your NEBO® sales manager.



#6008

## O² BEAM

- 4x adjustable zoom with O² Technology™
  - Anodized aircraft-grade aluminum; water and impact-resistant
  - Universal Long Gun Mount; no tools required
  - Activation with pressure switch or flashlight end cap
- MSRP: \$89.99

#6119

## SC-60R

- 60 lumen light / adjustable red laser sight
  - Adjustable hinge mount design; no tools required
  - Heavy-duty fiber reinforced plastic water and impact-resistant
  - Easy operation with power disable button for transport
- MSRP: \$129.99



#6269

## OPT-32RG

- Integrated Weaver® / Picatinny dual mounting system
  - Red and green cross hair reticle
  - 3-9x magnification
  - Weatherproof and fog-proof
- MSRP: \$129.99

#6696

## BAT LIGHT

- 1,000 lumen light
  - Ergonomic textured handle; rubberized protective sleeve
  - Anodized aircraft-grade aluminum; water and impact-resistant
  - Lanyard included
- MSRP: \$39.99



#5932 & #5933

## SAFETY GLASSES

- High-grade polycarbonate lenses
  - Anti-static, anti-scratch with 99.9% UVA / UVB protection
  - Lightweight nylon frames with adjustable temples
  - Adjustable strap and lens cleaning storage bag included
- MSRP: \$7.99



CALL TOLL FREE: 800-255-6061 or VISIT OUR WEBSITE: [WWW.IPROTEC.COM](http://WWW.IPROTEC.COM)

iPROTEC®, 3025 N. Great Southwest Parkway, Grand Prairie, TX 75050

Quarrow offers a wide variety of products, essential to any fisherman... or woman. From fishing rods and reels to must-haves for the tackle box, Quarrow has the perfect gear for all of your fishing needs.

There's more than one right choice for fishing accessories and gear. Quarrow just happens to be the BEST choice.

See the full line up of fishing lights, tools and accessories in our latest Quarrow® catalog.



For additional information, catalog requests, or to place an order, please contact your NEBO sales manager.



#6062  
**180 LED Submersible Fishing Light**

- 1,250 lumen output
  - Impact-resistant and waterproof
  - 12V DC battery clips included
  - 20' cable
- MSRP: \$84.99



#6502  
**Turtle 10 Pocket Tool**

- Features 10 tools in 1
  - Compact, folding design
  - Stainless steel body
- MSRP: \$9.99



#6069  
**2-Sided Fly Box**

- Strong ABS plastic body
  - Tight locking latch
  - Pre-cut foam fly slots
  - Water-resistant gasket
- MSRP: \$19.99



#6201  
**60 Lumen Zoom Light**

- 6x adjustable zoom
  - Water and impact-resistant
  - One size fits all head strap
  - Batteries included
- MSRP: \$14.99



#5487  
**Trout Combo Outfit**

- 8'6" 5 piece 5 weight IM7 graphite fly rod
  - Large arbor disc drag fly reel
  - 50 yards backing line
  - Carrying case included
- MSRP: \$119.99

**Quarrow®**

CALL TOLL FREE: 800-255-6061 or VISIT OUR WEBSITE: [WWW.QUARROW.COM](http://WWW.QUARROW.COM)

Quarrow®, 3025 N. Great Southwest Parkway, Grand Prairie, TX 75050

**NEBO®**  
**ARC500**  
 RECHARGEABLE BIKE LIGHT



The ARC500 Rechargeable Bike Light features 2 independently controlled light sources - a 500 lumen spot light and a 120 lumen C·O·B flood light. The C·O·B flood light covers 250° using **ARCUS LED Technology**, which allows the user to be visible from multiple angles, enhancing the user's safety.

**2 LIGHT MODES - SPOT LIGHT**

- High (500 lumens) - 2.5 hours / 188 meters
- Low (170 lumens) - 3.25 hours / 105 meters

**4 LIGHT MODES - C·O·B FLOOD LIGHT**

- High (120 lumens) - 4.5 hours / 18 meters
- Low (60 lumens) - 7.5 hours / 13 meters
- Day Flash - 30 hours / 7 meters
- Night Flash - 6 hours / 14 meters

**DESIGN**

- Fully rechargeable
- Water and impact-resistant
- Mount allows light to swivel 90°
- Tool-free universal mounting system
- Quick-release mount design
- Battery charging indicator

**OPERATION**

- Top-positioned, independently controlled ON/OFF buttons for spot and flood light

**ACCESSORIES**


- USB to Micro USB charging cable (included)

**BATTERIES**

- Internal, rechargeable lithium-ion battery (Recharge time: 2 - 4 hours)

**SPECS**

- 0.4 lbs.
- (H) 4.825" x (W) 1.625"

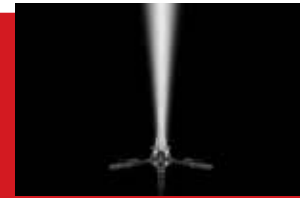

Each ARC500 features 'TRY ME' packaging and comes with an instruction manual

**Dimensions**

(H) 7" x (W) 3.625" x (D) 2.75"



**NEBO®**  
**ARC250**  
 PRO BIKE LIGHT

The ARC250 Pro Bike Light features 2 independently controlled light sources, a 250 lumen spot light and a 115 lumen C·O·B flood light. The C·O·B flood light covers 250° using **ARCUS LED Technology**, which allows the user to be visible from multiple angles, enhancing the user's safety.

**2 LIGHT MODES - SPOT LIGHT**

- High (250 lumens) - 9 hours / 133 meters
- Low (120 lumens) - 15 hours / 86 meters

**4 LIGHT MODES - C·O·B FLOOD LIGHT**

- High (115 lumens) - 14 hours / 15 meters
- Low (60 lumens) - 23 hours / 11 meters
- Day Flash (15 lumens) - 24 hours / 15 meters
- Night Flash (15 lumens) - 15 hours / 15 meters

**DESIGN**

- Water and impact-resistant
- Mount allows light to swivel 90°
- Tool-free universal mounting system
- Quick-release mount design
- Battery / power indicator

**OPERATION**



- Top-positioned, independently controlled ON/OFF buttons for spot and flood light

**BATTERIES**

- Powered by 3 AA batteries (included)

**SPECS**

- 0.4 lbs.
- (H) 4.825" x (W) 1.625"

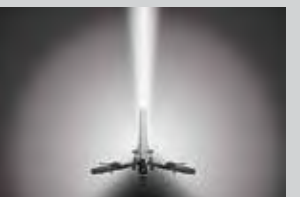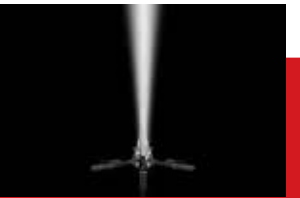

Each ARC250 features 'TRY ME' packaging and comes with an instruction manual

**Dimensions**

(H) 7" x (W) 3.625" x (D) 2.75"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK	UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397931966	6641	ARC500 Rechargeable Bike Light	39.99	6 PIECES	645397931218	6514	ARC250 Pro Bike Light	29.99	6 PIECES

# NEBO® 75 Lumen 5 LED Red Bike Light / Tail Light COMBO

The Bike Light Combo by NEBO® is designed to provide maximum visibility and safety while you are riding. Each light features a bar mount that secures to the bike with no tools needed. Lights also have a quick release feature that allows the lights to be easily removed from the bar mount.




- 4 LIGHT MODES - HEAD LIGHT**
- High (75 lumens) - 3 hours / 65 meters
  - Low (37.5 lumens) - 4.7 hours / 32 meters
  - Strobe (75 lumens) - 5.3 hours / 65 meters
  - S.O.S. (75 lumens) - 3.5 hours / 65 meters



- 7 LIGHT MODES - TAIL LIGHT**
- On (3.5 lumens) - 55 hours / 1.6 KM
  - Flash, Slow flash, Cascading, Rising, Rapid cascade, Random flash (120 hours / 1.6 KM)



- MOUNT STYLE**
- Self locking, universal bar mount; no tools required
- DESIGN**
- Water and impact-resistant
  - Quick-release tab quickly detaches light
  - Mount allows head light to swivel 180°
  - Tail light features strong clip

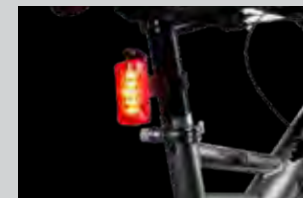

- OPERATION**
- ON/OFF button

- ACCESSORIES**
- Lanyard included

- BATTERIES**
- 3 AAA batteries included for head light
  - 2 AAA batteries included for tail light

- SPECS**
- #5952: 0.15 lbs. / #5953: 0.2 lbs.
  - #5952: (H) 2.75" x (W) 1.25" x (D) 3.5"
  - #5953: (L) 3.875" x (W) 1.25" x (D) 3"



**#5952 Clamshell Dimensions**  
(H) 6.625" x (W) 5.5" x (D) 2"

**#5953 Clamshell Dimensions**  
(H) 9.25" x (W) 5.75" x (D) 2.5"



# NEBO® 250<sup>PSI</sup> AIR COMPRESSOR

The 250 PSI Air Compressor by NEBO® Sports is a 12V portable air compressor that can inflate a standard size bicycle tire in less than a minute! While designed for bicycle tires, this Air Compressor has the power to use on your vehicle as well. This compact, portable Air Compressor is a perfect addition to your trunk for when those inconvenient, yet inevitable flat tires occur.



- DESIGN**
- 250 PSI (Pounds per Square Inch)
  - Inflates standard size bicycle tires in less than a minute
  - 12V DC plug
  - Easy-to-read PSI gauge
  - 18" Air Hose
  - 10' 12V DC Power Cord
  - Ergonomic thumb-lock lever



- DESIGN**
- 1.94 lbs.
  - (L) 6.5" x (W) 3.5" x (H) 5.25"



**Clamshell Dimensions**  
(H) 7.875" x (W) 5.5" x (D) 2.5"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397064121	5953	Bike Light Combo	24.99	6 PIECES
645397063124	5952	5 Red LED Tail Light	9.99	6 PIECES

UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
645397812111	5611	250 PSI Air Compressor	19.99	12 PIECES

# OLD RED

The Old Red is a 15 LED, 100 lumen lantern that brings classic charm and warm, inviting light to any space. Blending rustic design with modern technology, the Old Red features a realistic flickering flame and a control to adjust the amount of light that is generated. No smoke and no fire...the Old Red operates for hours on end with 4 AA batteries, which are included.



**ADJUSTABLE LIGHT OUTPUT**  
 • High (100 lumens) - 9 hours / 15 meters  
 • Low - 80 hours



**DESIGN**  
 • Metal construction with wire-guarded glass globe  
 • Hanging hook  
 • No fire, realistic flickering flame

**BATTERIES**  
 • Powered by 4 AA batteries (included)

**SPECS**  
 • 0.9 lbs.  
 • (H) 9" x (D) 4.5" x (W) 4.5"



Moves  
just like  
a real flame!



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
044435917779	6642	Old Red Lantern	19.99	4 PIECES

# 15 LED LANTERN

This 15 LED Lantern is the perfect blend between classic design and modern technology. This 9" high metal lantern has a wire-guard to protect the glass globe. No kerosene, no lamp oil and no citronella...this 15 LED is completely battery operated (batteries not included.) To maintain the functionality of a traditional kerosene lantern, this 15 LED Lantern has a control to adjust the amount of light that is generated. A reflector is positioned above the LEDs to cast the light evenly in every direction. Perfect for indoor or outdoor use, this lantern generates over 96 hours of continuous bright light. The 15 LED Lantern, the traditional lantern look with efficient LED lighting!



**ADJUSTABLE LIGHT OUTPUT**  
 • High (25 lumens) - 96 hours / 5 meters

**DESIGN**  
 • Metal construction with wire-guarded glass globe  
 • Hanging hook  
 • 25 lumens  
 • 96 hours of continuous light  
 • Adjustable light output  
 • Powered by 2 D batteries (not included)

**SPECS**  
 • 0.9 lbs.  
 • (H) 9" x (D) 4.5" x (W) 4.5"



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
044435627104	5572	15 LED Lantern	12.99	4 PIECES

# OIL LANTERN

The Oil Lantern captures a classic design and technology that has been around since 1850. This 12" high metal lantern has a wire-guard to protect the glass globe. The fuel tank is 12 oz., which provides 35 hours of burn time on a full tank. The Oil Lantern has a control to adjust the wick height and light output (2 wicks included.) This lantern can be used indoors to provide light during power outages, or to just add a warm glow to any room. Also perfect for outdoor use as well for camping, hunting or any outdoor recreational activity.



**DESIGN**

 
- Metal construction with wire-guarded glass globe
- Hanging hook
- 12oz. fuel capacity
- 35 hours of burn time
- Adjustable light output
- Uses kerosene, lamp or citronella oil ONLY
- Child-proof fuel tank cap

**SPECS**

- 1.233 lbs.
- (H) 12" x (D) 5.5" x (W) 7"



**ASSORTED COLORS**



NEBO® offers custom screen printing and laser engraving services on most all products. Utilize NEBO® products to advertise your company or event!

**QUANTITY REQUIREMENTS**

Custom printing orders must be a minimum of 100 pieces.

**LEAD TIME**

Allow 15-20 business days for production time.

**SHIPPING**

All orders ship FOB Grand Prairie, TX. Prepaid DOES NOT apply for custom print orders.

**PAYMENT**

Orders will not be released for printing until payment has been received in full, via credit card or CIA.

**LOGO**

Orders over 1,000 pieces may have the NEBO and product logos removed.

**Top Customer Picks**

- #6327 Larry C (pg. 34)
- #5089 CSI Holster (pg. 61)
- #6434 SLYDE KING (pg. 25)
- #6306 BIG Larry (pg. 32)
- #6373 LiL Larry (pg. 33)
- #6109 iPROTEC RM190 (N/A)
- #6431 Larry BOSS (pg. 30)
- #6525/#6618 SLYDE+ (pg. 24)
- #6311 TRANSPORT (pg. 54)
- #6542 REDLINE Blast (pg. 37)

**Screen Printing Prices**

- 100 - 499 pieces = Dealer price + \$2.00 per unit
- 500 - 999 pieces = Dealer price + \$1.50 per unit
- 1000+ pieces = Dealer price + \$1.00 per unit

**Laser Engraving Prices**

- 100 - 499 pieces = Dealer price + \$2.50 per unit
- 500 - 999 pieces = Dealer price + \$2.00 per unit
- 1000+ pieces = Dealer price + \$1.50 per unit

\*There is a one-time \$35 fee (per custom print/engrave order), which includes the setup for either screen printing or laser engraving. This setup fee covers the logo/text printed in a single location on the product, using a single color. There is an additional charge for printing or laser engraving on multiple locations or printing in more than one color.



UPC CODE	ITEM	DESCRIPTION	MSRP	CASE PACK
044435915393	6048	Oil Lantern	8.99	4 PIECES

CONTACT YOUR SALES MANAGER FOR ADDITIONAL INFORMATION: 800-255-6061

# Free-Standing Display

The NEBO Free-Standing Display gives your NEBO products the attention that they deserve. Allow your customers to browse all of your best-selling NEBO products in one convenient location. Equipped with enough shelf storage to hold 16 NEBO skus, the display also has 2 metal clip strips on the side to hold additional products or promo materials.

- DESIGN**
- All metal construction
  - Double-sided display
  - Locking casters
  - Holds 16 NEBO skus
  - 12 adjustable shelves
  - 2 footer shelves
  - 2 metal clip strips
- ASSEMBLY**
- Easy 10 minute assembly
  - Instructions, tools and plan-o-gram provided
- SPECS**
- 100 lbs.
  - (H) 74" x (W) 26" x (D) 24"



Easily adjustable shelving    2 metal clip strips included

Double-sided display    4 locking casters

Contact your NEBO Sales Manger to find out how to get your Free-Standing Display for FREE!!!

UPC CODE	ITEM	DESCRIPTION
645397932253	6654	NEBO Free-Standing Display

# The next best thing to NEBO lights

# NEBO GEAR



**NEBO Cap (Brown)** - Two tone mesh back trucker hat. Embroidered. One size fits all.



**NEBO Cap (Blue)** - Two tone mesh back trucker hat. Embroidered. One size fits all.



**NEBO Cap (Camo)** - Two tone mesh back trucker hat. Embroidered. One size fits all.



**NEBO T-Shirt** - 50/50 cotton blend. Screen printed. Check for available colors. (M, L, XL & XXL)



**NEBO Socks** - Cotton socks with embroidered NEBO logo. Set equals 1 pair of each.



**NEBO Cap (Red)** - 5 panel cotton Chino cap. Embroidered. Adjustable for all sizes.

## NEBO GEAR

ITEM	DESCRIPTION	MSRP	CASE PACK
#5115	NEBO T-Shirt (M)	14.95	6 PIECES
#5116	NEBO T-Shirt (L)	14.95	6 PIECES
#5117	NEBO T-Shirt (XL)	14.95	6 PIECES
#5118	NEBO T-Shirt (XXL)	14.95	6 PIECES
#6289	NEBO Socks	5.95	6 PIECES
#6462	NEBO Cap - Red	14.95	6 PIECES
#6551	NEBO 30 oz. Tumbler	19.95	6 PIECES
#6552	NEBO Cap - Brown	14.95	6 PIECES
#6553	NEBO Cap - Blue	14.95	6 PIECES
#6554	NEBO Cap - Camo	14.95	6 PIECES

\*Styles and colors may vary for caps and t-shirts.



**NEBO Tumbler** - Double wall 30 oz. 18/8 stainless steel. Keeps drinks super cold or hot. No leak cap.

UPC CODE	ITEM	NEBO® Tools	DISPLAY	MSRP	CASE PACK	PAGE #
Flashlights and Lighting						
645397900306	5423	BENDBRITE™ Hands-Free Flex Light	Display	\$9.99	16 PIECES	55
645397900702	5519	EDGE™ 50 Lumen Flashlight	Display	\$9.99	24 PIECES	56
645397107125	5872	CSI EDGE™ 90 Flashlight	Display	\$12.99	24 PIECES	56
645397058120	5947	ZOOM™ 370 LUX Flashlight	Display	\$11.99	16 PIECES	57
645397929215	6003	90 Lumen Headlamp	Clamshell	\$16.99	6 PIECES	49
645397929475	6085	EDGE 200™ Flashlight	Display	\$15.99	20 PIECES	56
645397929499	6092	REDLINE® OC™ Flashlight	Display	\$19.99	16 PIECES	41
645397929529	6095	LUMO® Clip Light	Display	\$5.99	48 PIECES	50
645397929864	6157	LUMO® Clip Light (Red)	Bulk	\$5.99	12 PIECES	50
645397929871	6158	LUMO® Clip Light (Silver)	Bulk	\$5.99	12 PIECES	50
645397929888	6159	LUMO® Clip Light (Blue)	Bulk	\$5.99	12 PIECES	50
645397929895	6160	LUMO® Clip Light (Black)	Bulk	\$5.99	12 PIECES	50
645397930013	6189	REDLINE® Select RC Flashlight	Display	\$69.99	6 PIECES	40
645397930167	6272-A	Micro REDLINE® OC™ Flashlight	Display	\$14.99	16 PIECES	39
645397930341	6304	WORKBRITE 2™ C-O-B LED Work Light	Display	\$19.99	12 PIECES	44
645397930358	6305	The Rechargeable WORKBRITE 2™	Display	\$29.99	12 PIECES	45
645397930365	6306	BIG Larry® Power C-O-B LED Work Light	Display	\$24.99	14 PIECES	32
645397930396	6311	TRANSPORT® 12V DC Rechargeable Flashlight	Display	\$19.99	18 PIECES	54
645397930402	6327	Larry® C-O-B LED Work Light	Display	\$8.99	24 PIECES	34
645397930426	6329	LuMORE™ Clip Light	Display	\$5.99	48 PIECES	51
645397930433	6347	CaseBrite™ iPhone 6/6S Case + Light (Black)	Bulk	\$39.99	4 PIECES	46
645397930440	6348	CaseBrite™ iPhone 6/6S Plus Case + Light (Black)	Bulk	\$39.99	4 PIECES	46
645397930457	6349	CaseBrite™ Countertop Display	Display	FREE with 12 piece order	1 PIECE	46,47
645397930464	6350	Larry® C-O-B LED Work Light - Bulk Red	Bulk	\$8.99	12 PIECES	34
645397930471	6351	Larry® C-O-B LED Work Light - Bulk Blue	Bulk	\$8.99	12 PIECES	34
645397930488	6352	Larry® C-O-B LED Work Light - Bulk Gray	Bulk	\$8.99	12 PIECES	34
645397930495	6353	Larry® C-O-B LED Work Light - Bulk Yellow	Bulk	\$8.99	12 PIECES	34
645397930501	6354	Larry® C-O-B LED Work Light - Bulk Camo	Bulk	\$8.99	12 PIECES	34
645397930518	6355	Lucy® C-O-B LED Work Light - Bulk Pink	Bulk	\$8.99	12 PIECES	34
645397930525	6357	LuMORE™ Clip Light - Bulk White	Bulk	\$5.99	12 PIECES	51
645397930532	6358	LuMORE™ Clip Light - Bulk Red	Bulk	\$5.99	12 PIECES	51
645397930549	6359	LuMORE™ Clip Light - Bulk Blue	Bulk	\$5.99	12 PIECES	51
645397930556	6360	LuMORE™ Clip Light - Bulk Green	Bulk	\$5.99	12 PIECES	51
645397930563	6372	TWYST® Z Work Light, Lantern & Flashlight	Display	\$29.99	16 PIECES	42
645397930570	6373	LiL Larry® C-O-B LED Work Light	Display	\$19.99	18 PIECES	33
645397930648	6382	BIG Larry® C-O-B LED Work Light - Bulk Camo	Bulk	\$24.99	7 PIECES	32
645397930679	6384	BIG Larry® C-O-B LED Work Light - Bulk Black	Bulk	\$24.99	7 PIECES	32
645397930686	6385	BIG Larry® C-O-B LED Work Light - Bulk Silver	Bulk	\$24.99	7 PIECES	32
645397930693	6386	CaseBrite™ iPhone 6/6S Case + Light (White)	Bulk	\$39.99	4 PIECES	46
645397930709	6387	CaseBrite™ iPhone 6/6S Plus Case + Light (White)	Bulk	\$39.99	4 PIECES	46
645397930747	6391	Twin Pucks Task Light & Emergency Beacon	Display	\$19.99	12 PIECES	52
645397930754	6392	REDLINE® RC™ with MagDock	Display	\$39.99	10 PIECES	38
645397930792	6413	BIG Larry® C-O-B LED Work Light - Bulk Red	Bulk	\$24.99	7 PIECES	32
645397930860	6431	Larry® BOSS Power C-O-B Work Light	Display	\$34.99	12 PIECES	30
645397930877	6433	TEMPRA™ IR Surface Thermometer & Spot Light	Display	\$49.99	8 PIECES	53
645397930884	6434	SLYDE™ KING Flashlight and Work Light	Display	\$39.99	12 PIECES	25
645397930907	6436	TWYST® Z Work Light, Lantern & Flashlight - Bulk Black	Bulk	\$29.99	12 PIECES	42
645397930914	6437	CRYKET™ C-O-B Work Light & Spot Light	Display	\$24.99	16 PIECES	43
645397930983	6444	DUO 250+ Lumen Headlamp	Display	\$24.99	12 PIECES	48
645397930990	6458	Z-Bug™ Bulb	Display	\$19.99	16 PIECES	29
645397931027	6463	LiL Larry® - Bulk Red	Bulk	\$19.99	9 PIECES	33
645397931034	6464	LiL Larry® - Bulk Black	Bulk	\$19.99	9 PIECES	33
645397931041	6465	LiL Larry® - Bulk Silver	Bulk	\$19.99	9 PIECES	33
645397931058	6466	LiL Larry® - Bulk Camo	Bulk	\$19.99	9 PIECES	33
645397931065	6467	TRANSPORT® 12V DC Rechargeable Flashlight - Bulk Black	Bulk	\$19.99	6 PIECES	54
645397931072	6468	TRANSPORT® 12V DC Rechargeable Flashlight - Bulk Silver	Bulk	\$19.99	6 PIECES	54
645397931140	6492	LiL Larry® - Bulk Patriotic	Bulk	\$19.99	9 PIECES	33
645397931157	6493	BIG Larry® C-O-B LED Work Light - Bulk Patriotic	Bulk	\$24.99	7 PIECES	32

645397931201	6513	CaseBrite™ Samsung Galaxy S7 Case + Light	Display	\$39.99	4 PIECES	47
645397931225	6523	Flipit Portable LED Lights	Display / Clam	\$14.99	24 PIECES	23
645397931249	6525	SLYDE™+ Work Light & Flashlight	Display	\$29.99	16 PIECES	24
645397931300	6539-B	Larry® TILT Directional Pocket Work Light	Display	\$11.99	24 PIECES	35
645397931331	6542	REDLINE® BLAST 1400 Lumen Flashlight	Display	\$39.99	12 PIECES	37
645397931393	6549	CRYKET™ Camo	Bulk	\$24.99	12 PIECES	43
645397931454	6555	Poppy Lantern & Spot Light	Display	\$16.99	24 PIECES	27
645397931522	6557	POPLITE	Display	\$5.99	48 PIECES	26
645397931539	6558	Contemporary Flipit	Display / Clam	\$14.99	24 PIECES	22
645397931706	6587	Z-Bug™ Lantern + Light	Display	\$24.99	12 PIECES	28
645397931713	6594	Poppy Lantern & Spot Light - Bulk Red	Bulk	\$16.99	6 PIECES	27
645397931720	6595	Poppy Lantern & Spot Light - Bulk Dark Gray	Bulk	\$16.99	6 PIECES	27
645397931737	6596	Poppy Lantern & Spot Light - Bulk Yellow	Bulk	\$16.99	6 PIECES	27
645397931744	6597	Poppy Lantern & Spot Light - Bulk Green	Bulk	\$16.99	6 PIECES	27
645397931935	6618	SLYDE™+ Work Light & Flashlight - Camo	Bulk	\$29.99	8 PIECES	24
645397931942	6639	REDLINE® V 500 Lumen Flashlight	Display	\$24.99	16 PIECES	36
645397931959	6640	BIG Larry® PRO Power Work Light	Display	\$34.99	12 PIECES	31
645397931973	6643	SLYDE™ KING Flashlight and Work Light - Camo	Bulk	\$39.99	8 PIECES	25
645397931997	6647	CaseBrite™ iPhone 7 Case + Light (Black)	Bulk	\$39.99	4 PIECES	46
645397932000	6648	CaseBrite™ iPhone 7 Plus Case + Light (Black)	Bulk	\$39.99	4 PIECES	46
645397932017	6649	CaseBrite™ iPhone 7 Case + Light (White)	Bulk	\$39.99	4 PIECES	46
645397932024	6650	CaseBrite™ iPhone 7 Plus Case + Light (White)	Bulk	\$39.99	4 PIECES	46
645397932031	6651	Poppy Countertop Display	Display	FREE with 12 piece order	1 PIECE	27
645397932086	6657	LEO Work Light and Spot Light	Display	\$14.99	24 PIECES	14-15
645397932147	6665	TANGO Rechargeable Work Light & Spot Light	Display	\$39.99	10 PIECES	18-19
645397932154	6666	BIG CRYKET™ C-O-B Work Light & Spot Light	Display	\$29.99	16 PIECES	20-21
645397932178	6668	GLOW Light + Handle	Display	\$19.99	8 PIECES	16-17
645397932352	6690	EYE Light	Display / Clam	\$16.99	16 PIECES	8-9
645397932369	6691	REBEL 600 Lumen Task Light & Head Lamp	Display	\$34.99	12 PIECES	10-11
645397932376	6692	REDLINE BIG DADDY	Display	\$49.99	8 PIECES	6-7
645397932390	6694	SLIM Rechargeable Pocket Light	Display	\$29.99	12 PIECES	4-5
645397932437	6699	Flipit 400	Display	\$16.99	24 PIECES	12-13
645397932475	6703	REDLINE® V 500 Lumen Flashlight - Black	Display	\$24.99	8 PIECES	36

**Tools**

645397130406	4327	Ultra™ Socket Combination Kit	Box	\$24.99	12 PIECES	59
645397850892	5089	CSI Flashlight Holster	Display	\$3.99	10 PIECES	61
645397900504	5517	Folding Lock-Blade Utility Knife with Carabiner	Display/Clam	\$6.99	18 PIECES	60
645397610113	5606	14-in-1 Ultra™ Socket	Display	\$16.99	12 PIECES	58
645397035121	5922	Leather Flashlight Holster	Hang Tag	\$16.99	6 PIECES	61
645397069126	5958	Flashlight Holster	Hang Tag	\$6.99	10 PIECES	61
645397929284	6032	Flashlight Holster with Belt Loop	Display	\$6.99	10 PIECES	61
645397930181	6274	Flashlight Holster	Hang Tag	\$6.99	16 PIECES	61
645397930761	6393	BIG Larry® Flashlight Holster	Bulk	\$4.99	7 PIECES	32,61
645397931560	6561	Flashlight Holster	Hang Tag	\$6.99	16 PIECES	61

UPC CODE	ITEM	NEBO® Sports	DISPLAY	MSRP	CASE PACK	PAGE #
645397812111	5611	250 PSI Air Compressor	Clamshell	\$19.99	12 PIECES	71
645397063124	5952	5 Red LED Rear Bike Light	Clamshell	\$9.99	6 PIECES	70
645397064121	5953	Bike Light Combo	Clamshell	\$24.99	6 PIECES	70
645397931218	6514	ARC250 Pro Bike Light	Clamshell	\$29.99	6 PIECES	69
645397931966	6641	ARC500 Rechargeable Bike Light	Clamshell	\$39.99	6 PIECES	68

UPC CODE	ITEM	WEATHERRITE® Outdoor	DISPLAY	MSRP	CASE PACK	PAGE #
044435627104	5572	15 LED Lantern	Hang Tag	\$12.99	4 PIECES	73
044435915393	6048	Oil Lanterns (Red & Black)	Hang Tag	\$8.99	4 PIECES	74
044435917779	6642	Old Red Lantern	Hang Tag	\$19.99	4 PIECES	72

**CALL TOLL FREE: 800-255-6061 or VISIT OUR WEBSITE: WWW.NEBOTOOLS.COM**

For more information or to place an order, contact your NEBO® Tools sales manager.

**SLIM**  
pg 4-5



**REDLINE®  
BIG DADDY**  
pg 6-7



**FLIPIT 400**  
pg 12-13



**EYE Light**  
pg 8-9



**REBEL**  
pg 10-11



**CALL TOLL FREE: 800-255-6061 or VISIT OUR WEBSITE: [WWW.NEBOTOOLS.COM](http://WWW.NEBOTOOLS.COM)**

For more information or to place an order, contact your NEBO® Tools sales manager.