

KICHLER® PRO SERIES WIRE CONNECTOR INSTALLATION INSTRUCTIONS

Always use caution. Turn off power. Use on electrical circuits of 15 volts or less.

Installation should always comply with local and national electrical codes




STEP 1

- Turn power off.
- Rotate wings fully apart.



STEP 2


Using the strip guide molded into the connector for reference, strip the wire to 11/16".

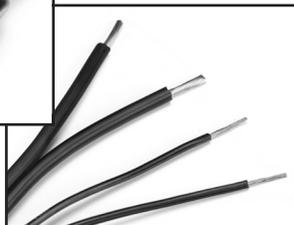

STEP 3

Insert wires into connector. Connector must be open.

- #12 in large holes
- #18 in small holes

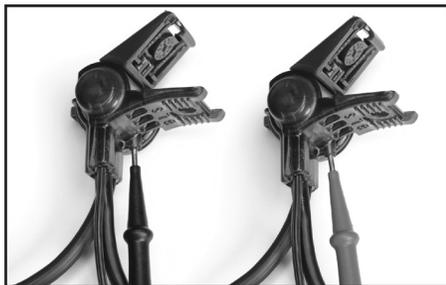

STEP 4


(Optional if testing voltage at fixture)

Turn power back on. With connector still open halfway, push voltmeter probe into connector probe port. Push probe all the way in and repeat on other connector.




STEP 5

Hold wires in place while squeezing wings together until the connector snaps shut. Use pliers if necessary to close. Repeat on other connector.

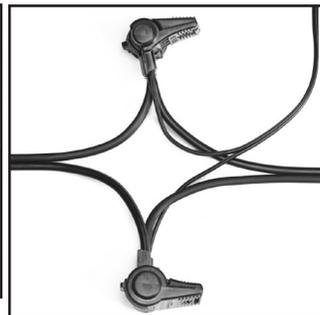

**FIXTURE INSTALLATION
SA120224**

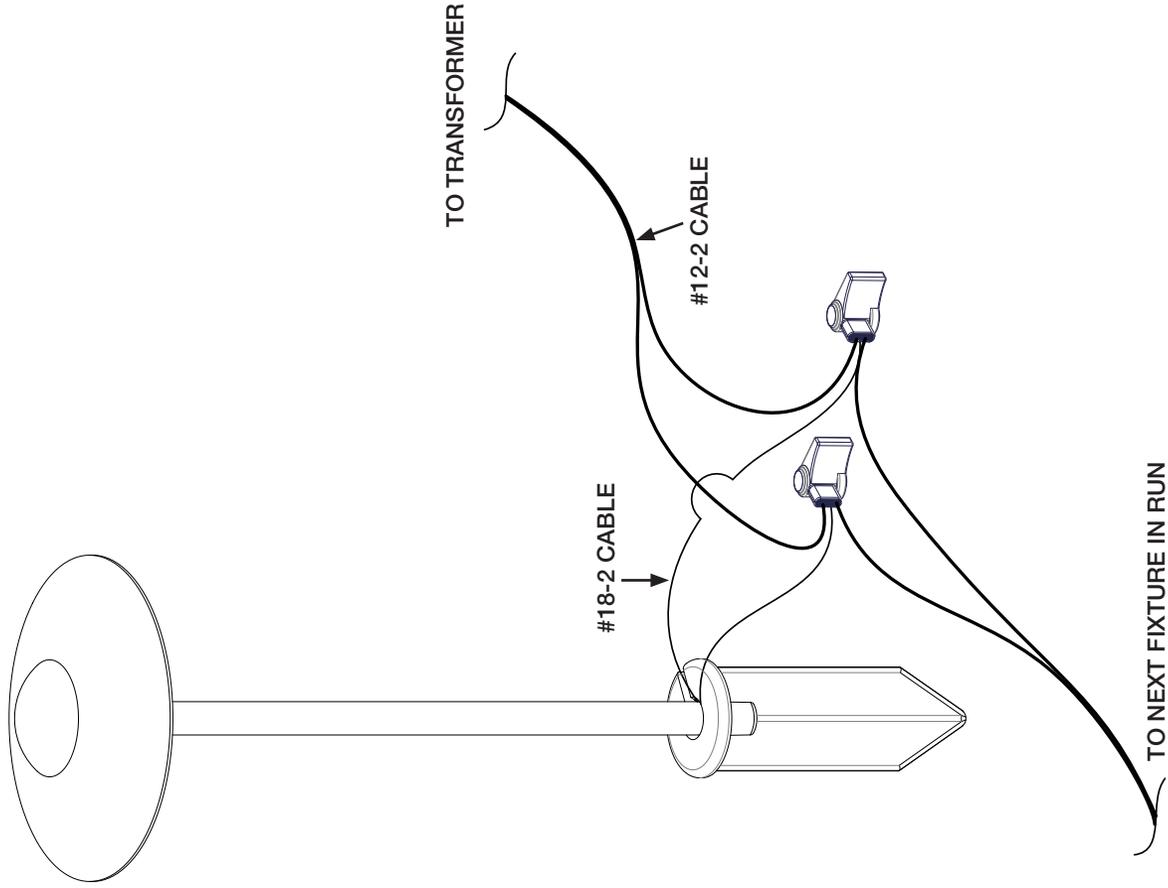

Intertek
4005-435

300 Volts Max, 105°C Max, Do Not Reuse, CU
Flamability V-2, Rain Tight, Water Tight, Direct Bury
Listed #4005435, Conforms to ANSI/UL Std. 486C
To Be Sold Only With Installation Instructions