

Wedge Anchors



Installation Instructions

W14134•W14214•W14314•W38214•W38234•W38300•W38334•W38500
W12234•W12334•W12400•W12512•WS14134•WS14214•WS14314
WS38214•WS38234•WS38300•WS38334•WS38500•WS12234•
WS12334•WS12400•WS12512

*Not Recommended for use in overhead applications

INSTALLATION PROCEDURES

Threaded Stud Version


Using the proper diameter bit, drill a hole into the base material to a depth of at least 1/2" or one anchor diameter deeper than the embedment required. The tolerances of the drill bit used should meet the requirements of ANSI Standard B212.15



Position the washer on the anchor and thread on the nut. Drive the anchor through the fixture into the anchor hole until the nut and washer are firmly seated against the fixture. Be sure the anchor is driven to the required embedment depth.



Blow the hole clean of dust and other material. Do not expand the anchor prior to installation

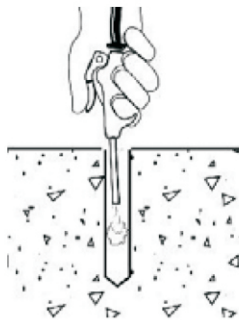

Tighten the anchor by turning the nut 3 to 5 turns past finger tight or by applying the guide installation torque from the finger tight position.

