
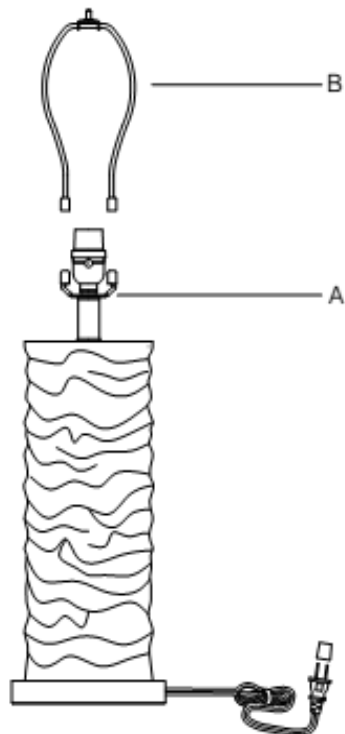


Installation Instruction

HARP SIZE: 9"

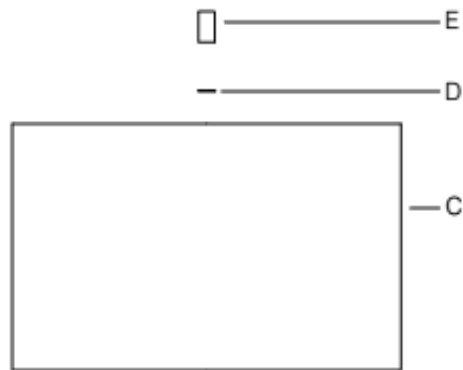

For Table Lamp

ITEM#: 12427-0

WARNING

- * Risk of shock, do not plug in the unit before assembly.
- * Do not exceed the maximum wattage rating. (Max.100W). NE PAS DEPASSER LA PUISSANCE NOMINALE MAXIMALE
- * Before turning on, please follow the instruction manual step by step.

INSTALLATION

1. Slide the two bushings on harp (B) up to expose the flat ends at the bottom.
2. Insert the flat ends of harp (B) into saddle (A).Slide the two bushings down to secure harp (B) into saddle (A).
3. Install a bight bulb into the lamp holder.
4. Align the center ring of shade (C) onto the threaded end of harp (B) .Use finial (E) to secure shade (C) and rubber washer (D) onto harp (B) .
- 5.Adjust the shade until it is leveled horizontally.

IMPORTANT SAFETY INSTRUCTIONS

This portable lamp has a polarized plug (one blade is wider than the other) as a safety feature to reduce the risk of electric shock. This plug will fit a polarized outlet only one way. If the plug does not fit fully into the outlet, reverse the plug. If it still does not fit, contact a qualified electrician. Never use with an extension cord unless the plug can be fully inserted. Do not change or alter the plug.

IN AN ONGOING EFFORT TO BE ENVIRONMENTALLY FRIENDLY AND IN COMPLIANCE WITH CALIFORNIA TITLE 20 AN ENERGY SAVING COMPACT FLUORESCENT BULB(S) IS INCLUDED. PLEASE NOTE THAT THE LIFE EXPECTANCY OF THE BULB(S) IS NOT GUARANTEED.

