

Please go to www.quoise.com for product cleaning tips. Go to the **Care + Maintenance** selection.

Tools Required: Flathead screwdriver, Phillips screwdriver, pliers, wire cutters, wire strippers, electrical tape, safety glasses.

Light Source: (3) Medium Base Bulbs (100W Maximum. Alternate Bulbs (3) 23W CFL.

Estimated Assembly Time: 20-30 minutes

Preparation: Identify and inspect all parts before beginning installation. Check package content list and diagrams below to be sure all parts are present. If any parts are missing or damaged, do not attempt to assemble, install, or operate the fixture. Contact customer service for replacement parts.


⚠ Warnings and Cautions

Turn off electricity at circuit breaker or main fuse box before installation. Consult a licensed electrician if in doubt.

These instructions are provided for your safety. It is very important you read them completely before installing the fixture. We strongly recommend that a licensed, professional electrician perform the installation.

Disconnect fixture from power source before replacing bulbs. Make sure bulbs are given sufficient time to cool before removal. Do not subject glass parts to any shock while in operation or shattering may result.

Package Contents

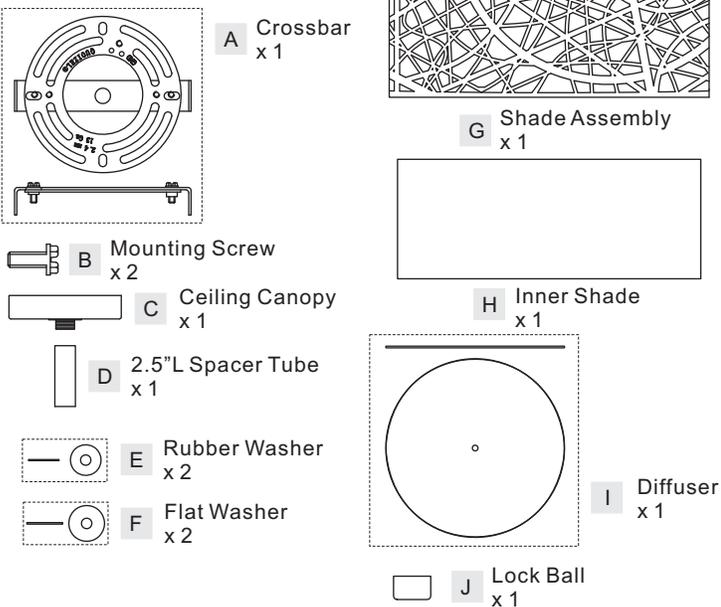

STEP 3 - Wire Connections

A. Use standard wire connectors (not included) to make all wire connections. (Connectors are not included with fixture.) Twist connectors until wires are tightly joined together. Wrap each connection with approved electrical tape and carefully stuff all the connected wires into the Outlet Box.

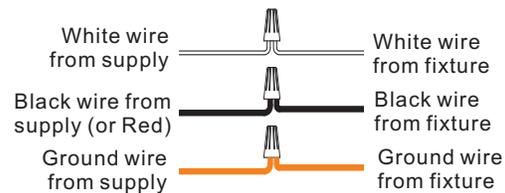


Figure 3

STEP 4 - Attach Ceiling Canopy to Crossbar

A. Line up the holes on the side of the Ceiling Canopy (C) to the mounting holes on the Crossbar (A). Secure them with Mounting Screws (B). Tighten until snug.

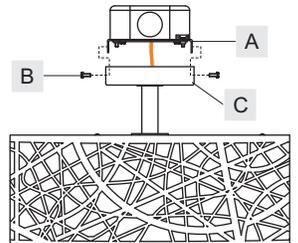


Figure 4

STEP 5 - Install Inner Shade, Diffuser and Bulbs

A. Adjust the Hex Nut on the bottom end of the Nipple to proper locations for rest components. Attach the Tabs on the bottom edge of the Inner Shade (H) to the Diffuser (I).
 C. Place Rubber Washers (E), Flat Washers (F), the Diffuser (I) with the Inner Shade (H) over the end of the Nipple as shown. Secure them together by threading the Lock Ball (J) onto the Nipple. Hand tighten until snug.
 C. This fixture uses standard bulb with medium base. Maximum 100 watts. Insert bulb and screw snugly into place.

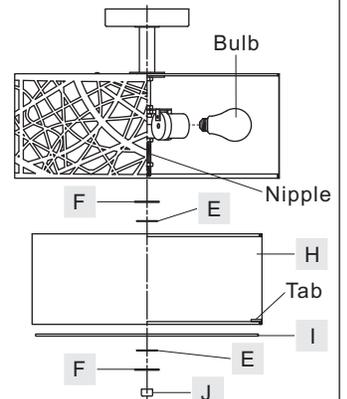


Figure 5

Your fixture is now assembled and ready to use. Enjoy!

STEP 1 - Install Ceiling Canopy to Shade Assembly

A. Screw one end of the Spacer Tube (D) onto the top center of the Shade Assembly (G) and hand tighten until snug.
 B. Thread the Ceiling Canopy (C) onto the top end of the Spacer Tube (D) and hand tighten until snug.

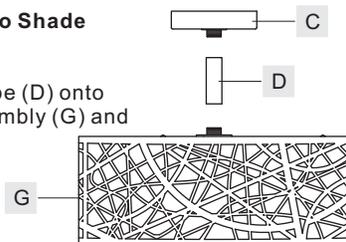


Figure 1

STEP 2 - Attach Crossbar to Outlet Box

A. Attach the Crossbar (A) to Outlet Box and secure by threading Outlet Box Screws (not supplied) into the Mounting Holes on the Outlet Box. Tighten until snug.



 
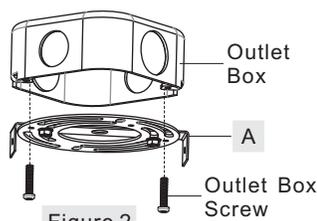


Figure 2

Thank you for purchasing a Quoizel product.
 Need assistance with parts or assembly? Call Quoizel customer service at 1-631-273-2700
 or visit us on-line at www.quoise.com

PCAE1715C

FINISH: POLISHED CHROME

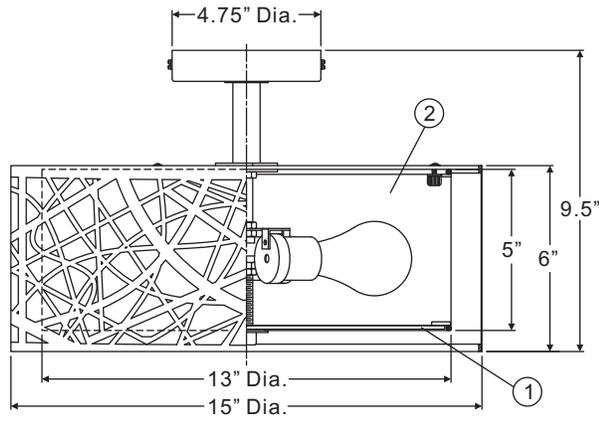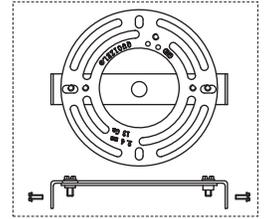

(3) 100W Medium Base Bulbs (Not Supplied)

NO.	PART NUMBER	REPLACEMENT PART	REQ.
1	G12252DI	DIFFUSER	1
2	G2362SH	SHADE	1

NOTE: ALL DIMENSIONS ARE ROUNDED UP TO THE NEAREST 1/4"

Thank you for purchasing a Quoizel product.
Need assistance with parts or assembly? Call Quoizel customer service at 1-631-273-2700
or visit us on-line at www.quoizel.com