

Please go to www.quoizel.com for product cleaning tips. Go to the **Care + Maintenance** selection.

Tools Required: None.

Light Source: (2) Medium Base 75W bulb Maximum, Alternate bulb (2) 19W CFL Maximum.

Estimated Assembly Time: 15-20 minutes

Preparation: Identify and inspect all parts before beginning installation. Check package content list and diagrams below to be sure all parts are present. If any parts are missing or damaged, do not attempt to assemble, install, or operate the fixture. Contact customer service for replacement parts.

⚠ Warnings and Cautions

Turn off electricity at circuit breaker or main fuse box before installation. Consult a licensed electrician if in doubt.

These instructions are provided for your safety. It is very important you read them completely before installing the fixture. We strongly recommend that a licensed, professional electrician perform the installation.

Disconnect fixture from power source before replacing bulbs. Make sure bulbs are given sufficient time to cool before removal. Do not subject glass parts to any shock while in operation or shattering may result.

⚠ Care of Tiffany Style Shade

A new tiffany lamp shade has an oil film applied to the shade that protects the tiffany shade from scratches during shipment. If the oil applied is too heavy you can remove the excess oil film with a paper towel. Gently wipe away the excess oil.

For general cleaning of tiffany shades use a gentle lemon oil-based furniture polish applied to a soft cloth and wipe gently.

If a white powder appears on the soldered joints of the tiffany shade this is a normal oxidation process. Use a small amount of lemon oil or mineral oil applied directly to oxidized areas and the soldered area will return to like new.

- A. Thread the Rod onto the Socket Assembly and hand tighten until snug. Place the Base, the Lock Washer and the Washer over the nipple on the bottom end of the Rod. Secure them together with the Thumb Nut. Hand tighten until snug.


- B. Thread the Hex Nut end of the Nipple with Hex Nut into the Hex Coupling on the top center of the Socket Assembly. By using pliers, thread the Hex Nut against the Hex Coupling and hand tighten until snug.

- C. Pass the Spacer Tube and the Check Ring over the top end of the Nipple with Hex Nut and secure with the Small Knurled Nut.

- D. Thread the Big Knurled Nut onto Nipple and adjust it to proper location for rest components. Place the Flat Washer and the Shade over the top end of the Nipple and secure with the Finial. Hand tighten until snug.


- E. This fixture uses standard bulb with medium base. Maximum 75 watts. Insert bulb and screw snugly into place.

Your fixture is now assembled and ready to use. Enjoy!

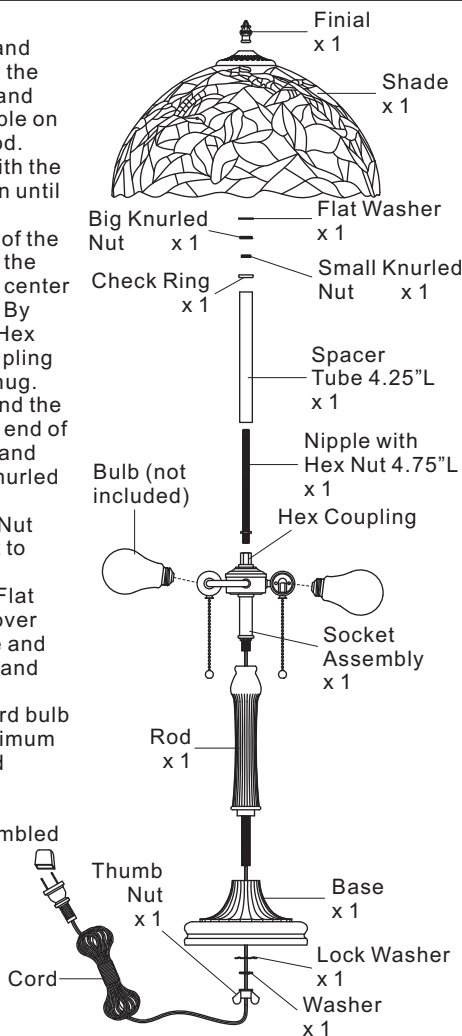

TF2801TVB

FINISH: VINTAGE BRONZE

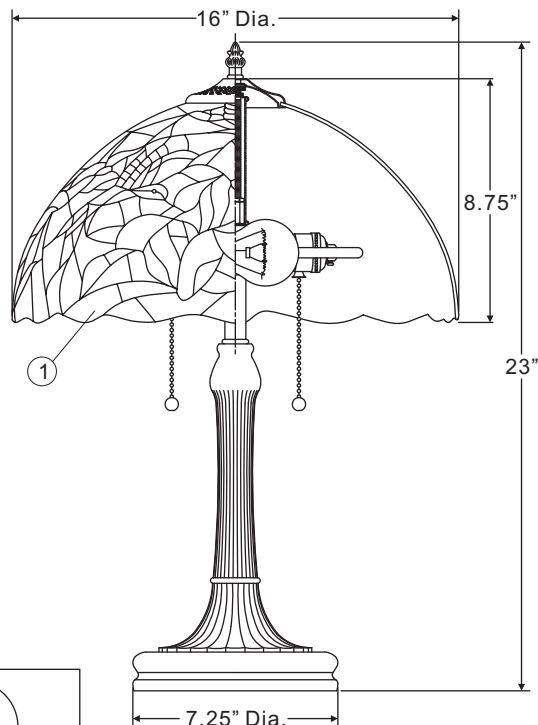

NOTE: ALL DIMENSIONS ARE ROUNDED UP TO THE NEAREST 1/4"

(2) 75W Medium Base Bulbs (Not Supplied)

NO.	PART NUMBER	REPLACEMENT PART	QTY.
1	G12820SH	SHADE	1

Thank you for purchasing a Quoizel product.

Need assistance with parts or assembly? Call Quoizel customer service at 1-800-645-3184 or visit us on-line at www.quoizel.com