

MINITRACK INSTALLATION INSTRUCTIONS

NORA LOW VOLTAGE MINITRACK & CONNECTORS

WARNING - RISK OF FIRE. MOST DWELLINGS BUILT BEFORE 1985 HAVE SUPPLY WIRES RATED FOR ONLY 60°C. CONSULT A QUALIFIED ELECTRICIAN BEFORE INSTALLING.

FIRE/ELECTRICAL HAZARD: INSTALL ACCORDING TO NATIONAL ELECTRIC CODE AND ANY APPLICABLE MUNICIPAL CODE REQUIREMENTS.

This equipment is intended to be installed only by qualified personnel. The installation must be made in accordance with the current edition to the National Electric Code and all applicable state and local building codes. The final installation must be approved by the appropriate qualified electrical/building inspector(s). Improper installation may result in a fire or electrical hazard. Be sure electrical power to the circuit has been disconnected before installing this electrical system.


Important Safety Operating Instructions

When installing or using this lighting system, basic safety precautions should always be followed, including the following:

1. Read and save all instructions.
2. Do not install this system in a damp or wet location.
3. Do not install any fixture closer than 6" from any curtain or similar combustible material.
4. CAUTION: THIS SYSTEM IS ONLY TO BE CONNECTED TO A 12-VOLT OR 24-VOLT ISOLATED TYPE TRANSFORMER SUPPLY. DO NOT EXCEED NOMINAL SUPPLY VOLTAGE. DO NOT EXCEED 24-VOLT AND 25-AMP CAPACITY OF SURFACE TRACK (300 WATTS AT 12-VOLTS AND 600 WATTS AT 24-VOLTS).
5. CAUTION: TO REDUCE RISK OF FIRE AND ELECTRICAL SHOCK, USE ONLY FIXTURES AND FITTINGS INTENDED FOR USE WITH NORA MINITRACK SERIES TRACK.

INSTALLING NORA MINITRACK SECTION



1. Mount the track to a dry, level surface. MiniTrack must be surface mounted only.
2. Secure the track section using the appropriate wood screws and/or drywall anchors. You must secure the track at every mounting hole to ensure proper mounting.
3. Note: Be sure to make provisions for connecting the power to the MiniTrack before mounting the track section.

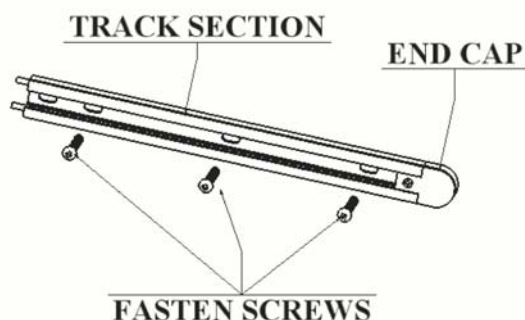

INSTALLING MINITRACK LUMINAIRE

Turn off power before beginning.

1. Install MR11, MR16 or T 3-1/4 Low Pressure Xenon lamp with the correct wattage and voltage in the fixture.
2. Hold fixture as illustrated and insert into MiniTrack.
3. Slide the outer collar of the track adaptor down and turn the fixture 90° to lock the fixture into the track.

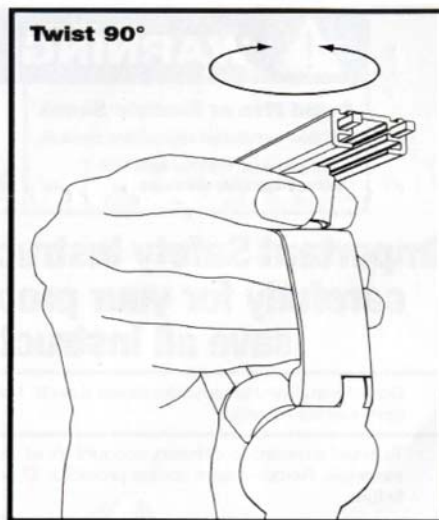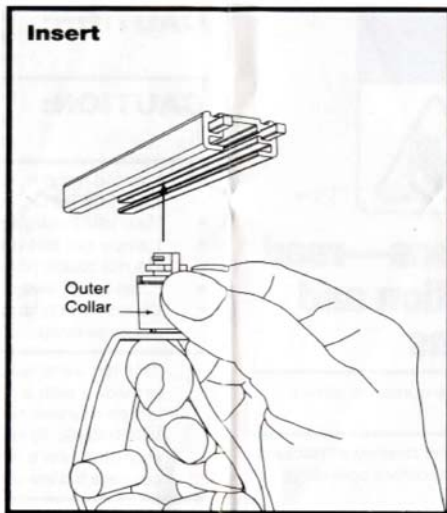

| Catalog No. | Lamp |
|-------------|--|
| NLMT-701 | 35W MAX. MR11, 12V/24V |
| NLMT-705 | |
| NLMT-707 | |
| NLMT-703 | 50W MAX. MR16, 12V/24V |
| NLMT-706 | |
| NLMT-709 | |
| NLMT-721 | 10W MAX. T 3-1/4 Wedge Base Low Pressure Xenon, 12V/24V |
| NLMT-722 | |