


AnyBODY™ Conduit Bodies


MORE
on
reverse

Aluminum & Plastic • Weather-tight Seal for Exterior Use

AnyBODY ships as an LB...

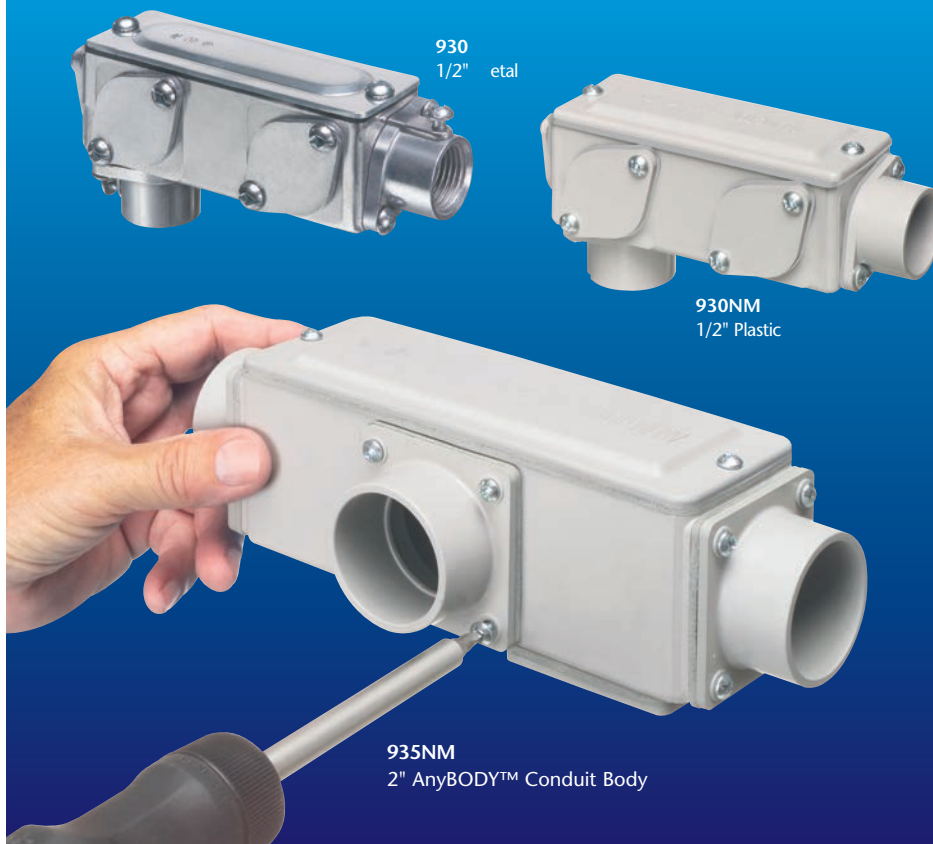

But converts to a T, LL, LR or C

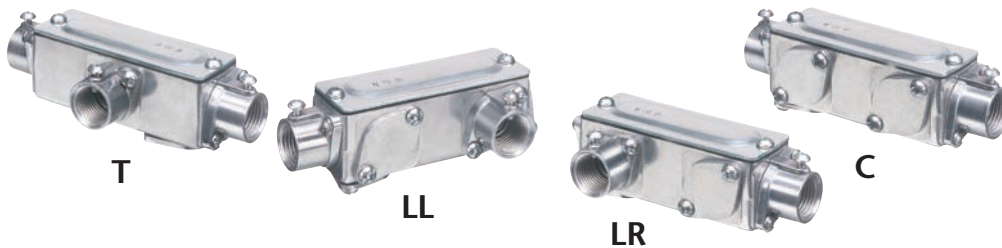

ee s t s e t e e

Arlington's aluminum or plastic AnyBODY ships as an LB, but converts to a T, LL, LR or C by simply inserting the standard flange and thread adapter into the body.

It's easy and convenient.

Plus, it saves you the hassle, space, and cost of stocking multiple different conduit bodies.

Whether your combination of 1 inch LBs, 1 inch NO E, RA CO, or the normally more than 10

Plastic

6 inch 1/2" to 4"

6 Includes the non-metallic flange and 1 inch "lu" in conduit joint

Aluminum

6 inch 1/2" to 4"

6 Includes the standard flange and the 1 inch "lu" in conduit joint

6 1/2" to 2" are combination EM /rid 5 the 1 inch standard flange and 1 inch "lu" in conduit joint, but also the 1 inch "lu" in conduit joint

6 at the 1 inch "lu" in conduit joint maintain 1 inch "lu" in conduit joint

6 L/C A List d



View Video



Arlington

1 Stauffer Industrial Park
Scranton, PA 18517

800/233.4717

Fax 570/562.0646


www.aifittings.com

Meets NEC 2011 314.16 (c) (2) for Conduit Bodies with Splices, Taps or Devices.


Patent pending

Any BODY™ Conduit Bodies

Aluminum & Plastic • Weather-tight Seal for Exterior Use

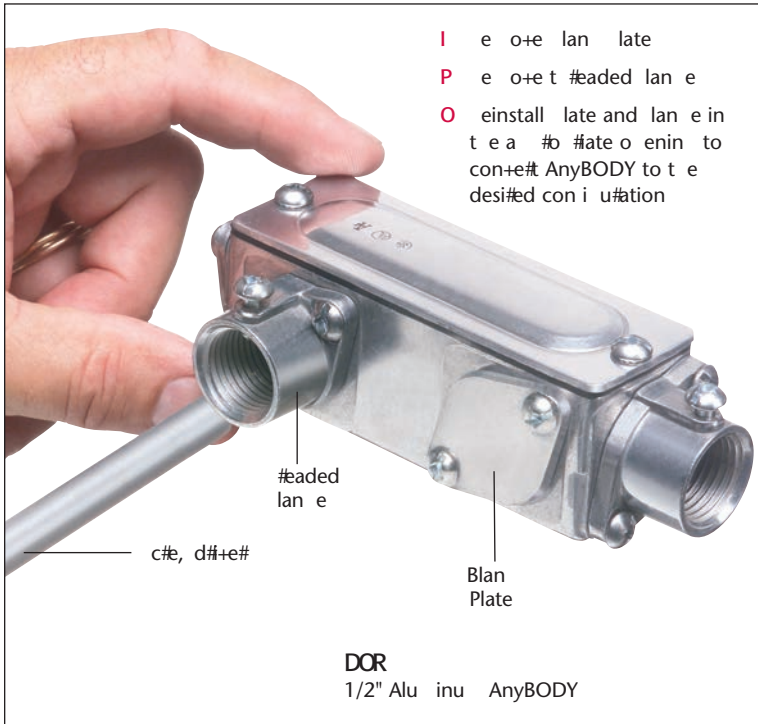

8ki rbrn#i s7D9S#trhg #U #C7#k#UN#B/ACI /#k#CC#
adb#AI MS#P 1S.

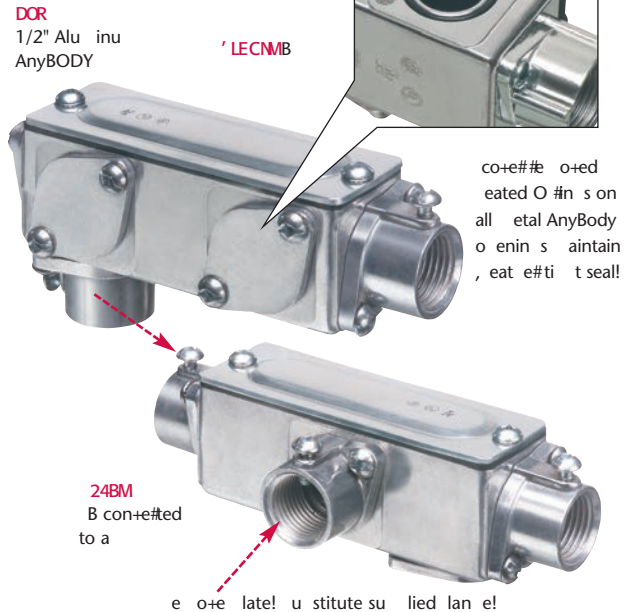

Meets NEC 2011 314.16 (c) (2) for Conduit Bodies with Splices, Taps or Devices.

(n' those conduit odies that are dura l' and le i l' ar ed ' the anufacturer with their volu e shall e per itted to contain splices, taps or devices. The a& u nu er of conductors shall e calculated in accordance with 314.16 (B). Conduit odies shall e supported in a ri id and secure anner)

Catalog Number	UPC/DEI/NAED Mfg. #018997	Description Aluminum or Plastic Body	Size	Unit Pkg	Std Pkg
17900		1 fpg & pg	1/2"	10	10
17901		with combination	3/4"	10	10
17902		set-screw/threaded	1"	5	5
17903		flanges for EMT,	1-1/4"	2	10
17904		rigid and IMC	1-1/2"	2	10
17905			2"	1	5
17906		1 fpg & pg	2-1/2"	1	1
17907		with threaded flanges	3"	1	1
17908		for rigid only	3-1/2"	1	1
17909			4"	1	1
12500		1 fpg & pg	1/2"	10	10
12501			3/4"	10	10
12502			1"	5	5
12503		includes	1-1/4"	2	10
12504		Three Flanges	1-1/2"	2	10
12505		with	2"	1	5
12506		Glue-in Conduit	2-1/2"	1	1
12507		Joints	3"	1	1
12508			3-1/2"	1	1
12509			4"	1	1



1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com



Distributed by