



# Color-Keyed®

## C-Tap

T&B Catalog Number:

54730

UPC Number:

78621054730

Status:

Active

Description:


Copper C-Tap, 600V, Wire Range-Main: 4-2, Branch 4-12, Length 1-5/32 Inch, Height 27/32 Inch, Die Code 42, Die Color Code Pink

### Features

Positive, all-around compression with low resistance and high pull-out values.

Ideal for pigtail, 2-way splicing or tapping to an unbroken continuous main.

Heavy reinforcing ribs help locate compression dies and strengthen compressed joint.

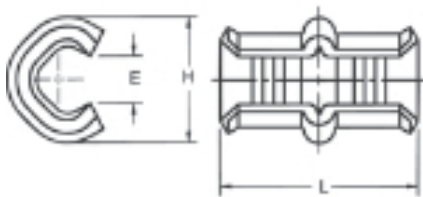

### General

Style	Standard
Material	Copper
Finish	Plain
Wire Size	4-2
Die Color	Pink
Die Code	42

### Dimension Information

H (inches)	27/32
L (inches)	1 5/32

### Specifications

Voltage Rating	600V
----------------	------

### Accessories & Components

Shrink Tubing	HS430
Hard Cover	HTC40

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	4 lbs. per 100

### Application Support

T&B Instruction Sheets	ta00628-tb2
------------------------	-------------

### Notes

Each C-Tap contains a range of conductor sizes. See Installation Instructions for wire range combinations.

UL approved for direct burial.

Taps can be supplied tin-plated. Add suffix TP to any catalog number.

### Certifications

RoHS Compliance Yes

## Certifications



File Nbr:

E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)