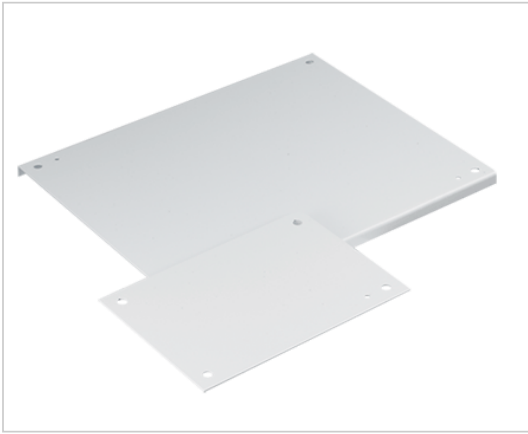


*Hoffman*

Panels for Type 3R, 4, 4X, 12 and 13 Enclosures

Catalog Number: A16P16
US List Price (USD): \$36.31

Bulletin Number:

- PNLWM

Material:

- Steel

**Model Code:**

- 23110

Ship Wt. Std. Pkg. (lbs):

- 5.24

Interchangeable:

- False

Finish:

- Painted Steel

Material:

- Painted steel

Description

Description:

Steel panels are 11 or 12 gauge, finished with white polyester powder paint or a conductive, corrosion-resistant coating. Larger panels have flanges on two or four sides. Some larger steel panels are 11 gauge and include extra holes for panel lifting. Aluminum panels are 5052-H32 aluminum alloy. Larger panels have flanges on four sides. Aluminum panels are protected on one side with a plastic film. Stainless steel panels are Type 316 stainless steel. Panel mounting hardware is furnished with all enclosures which accept these panels.

Technical Data

Panels for Type 3R, 4, 4X, 12 and 13 Enclosures

Catalog Number	A16P16
Panel Size D x E in.	13.00 x 13.00
Number of Holes	4
Panel Gauge or Thickness	12 ga.
Edge Flanges	0
T in.	—
Material	Painted Steel

Certifications



EU Certification

Documents



3D STEP CAD



2D DXF CAD



Spec Sheet



Dimension Drawing

No accessories available.