


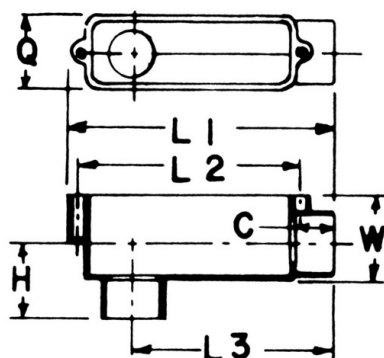

Rigid Non-Metallic Conduit Bodies & Covers

T&B Catalog Number:

UPC Number:

E986H

Status:

03448106545

Description:

Active

Type LB Conduit Body, Volume 32 Cubic Inches, Size 1-1/2 Inch, Length 6-13/32 Inches, Width 2-1/2 Inches, Material PVC, Color Gray, For use with Schedule 40 and 80 Conduit, Pack of 10

Features

Textured lids

Foam-in-place gasket

Application

For use with Rigid Conduit

General

Trade Size (inches)

1-1/2

Material

Non-Metallic

Volume (cu.in.)

32

Conduit Body Shape

LB

Dimension Information

C (inches)

1 3/32

H (inches)

2 5/16

L1 (inches)

7 31/32

L2 (inches)

6 13/32

L3 (inches)

6

Q (inches)

2 1/2

W (inches)

2 3/4

Packaging

Package in Units

10

T&B Sold in UOM

Each

T&B Weight Per UOM

80 lbs. per 100

Application Support

T&B Sales Drawings

wsd-ac05071

Rigid Non-metallic Conduit Bodies

Available on Website

Specifications & Applications

Available on Website

Certifications

RoHS Compliance

Yes

Certifications



File Nbr:

E11461

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com