 


312 Coilex® Baffle



312W White Trim with White Baffle
312P White Trim with Black Baffle



HOUSING / LAMP:

 
H7ICAT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7ICT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7RICAT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7RICT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30

DIMENSIONS: Height: 2-1/4" [57mm]; OD: 7-1/4" [184mm]

353 Metal Baffle



353SN Satin Nickel Trim with Satin Nickel Baffle
353TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle



HOUSING / LAMP:

 
H7ICAT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7ICT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7RICAT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30
H7RICT: 50W PAR30, 65W BR30, 75W PAR30L, 75W R30

DIMENSIONS: Height: 3" [76mm]; OD: 7-1/4" [184mm]

74 Eyeball 30° Tilt



74P White Trim and Eyeball



HOUSING / LAMP:

 
H7ICAT: 75W PAR30
H7ICT: 75W PAR30
H7RICAT: 75W PAR30
H7RICT: 75W PAR30

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 8" [203mm]

76 Adjustable Gimbal 30° Tilt



76P White Trim with Gimbal Ring



HOUSING / LAMP:

 
H7ICAT: 45W PAR38
H7ICT: 45W PAR38
H7RICAT: 45W PAR38
H7RICT: 45W PAR38

DIMENSIONS: OD: 8" [203mm], 30° tilt with screwbase lamp (50° tilt with side prong lamp where available)

77 Adjustable Eyeball 30° Tilt



77P White Trim with White Eyeball



HOUSING / LAMP:

H7ICAT: 50W PAR20, 75W R20
H7ICT: 50W PAR20, 75W R20
H7RICAT: 50W PAR20, 75W R20
H7RICT: 50W PAR20, 75W R20

DIMENSIONS: Aperture: 2-3/4" [70mm]; OD: 8" [203mm]

78 Eyeball 30° Tilt



78P White Trim with White Eyeball



78PAT White Trim with White Eyeball - AIR-TITE™ Trim



78SN Satin Nickel Trim with Satin Nickel Eyeball



 
78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball



78B Satin Brass Trim with Satin Brass Eyeball



78PB Polished Brass Trim with Polished Brass Eyeball



HOUSING / LAMP:

 
H7ICAT: 65W BR30, 75W R30, 75W PAR30L
H7ICT: 65W BR30, 75W R30, 75W PAR30L
H7RICAT: 65W BR30, 75W R30, 75W PAR30L
H7RICT: 65W BR30, 75W R30, 75W PAR30L

DIMENSIONS: Height: 4-1/8" [105mm]; Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

90 Double Bubble Adjustable 60° Tilt



90P White Trim and Eyeball



HOUSING / LAMP:

H7ICAT: 150W PAR38
H7ICT: 150W PAR38

DIMENSIONS: OD: 8" [203mm]

376 Adjustable 30° Tilt



376W White Trim Ring White Baffle



376P White Trim Ring Black Baffle



HOUSING / LAMP:

H7ICAT: 50W PAR30, 50W PAR30L
H7ICT: 50W PAR30, 50W PAR30L
H7RICAT: 50W PAR30, 50W PAR30L
H7RICT: 50W PAR30, 50W PAR30L

DIMENSIONS: OD: 7-1/4" [184mm]

 
378 Adjustable with Splay 25° Tilt



378 White Trim with Clear Specular Splay Trim



378P White Trim with White Splay Trim



HOUSING / LAMP:

H7ICAT: 35W PAR30L
H7ICT: 35W PAR30L
H7RICAT: 35W PAR30L
H7RICT: 35W PAR30L

DIMENSIONS: OD: 7-1/4" [184mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

478 Adjustable with Splay 25° Tilt



HOUSING / LAMP:
H71CAT: 45W PAR38
H71CT: 45W PAR38

DIMENSIONS: OD: 7-1/4" [184mm]

420 Regressed Eyeball 30° Tilt



HOUSING / LAMP:
H71CAT: 50W PAR30L, 50W PAR30, 60W BR30
H71CT: 50W PAR30L, 50W PAR30, 60W BR30
H71R1CAT: 50W PAR30L, 50W PAR30, 60W BR30
H71R1CT: 50W PAR30L, 50W PAR30, 60W BR30

DIMENSIONS: Height: 3-15/16" [100mm]; Aperture: 4" [102mm];
OD: 7-1/4" [184mm]

 
170 Albalite Lens with Reflector



HOUSING / LAMP:
H71CAT: 40W A19
H71CT: 40W A19
H71R1CAT: 40W A19
H71R1CT: 40W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

171 Drop Opal Lens with Reflector



HOUSING / LAMP:
H71CAT: 40W A19
H71CT: 40W A19
H71R1CAT: 40W A19
H71R1CT: 40W A19

DIMENSIONS: Height: 4" [102mm]; OD: 8" [203mm]

173 Fresnel Lens with Reflector



HOUSING / LAMP:
H71CAT: 40W A19
H71CT: 40W A19
H71R1CAT: 40W A19
H71R1CT: 40W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

172 Dome Lens with Reflector



HOUSING / LAMP:
H71CAT: 50W PAR30, 60W A19
H71CT: 50W PAR30, 60W A19
H71R1CAT: 50W PAR30, 60W A19
H71R1CT: 50W PAR30, 60W A19

DIMENSIONS: Height: 2-1/8" [54mm]; OD: 7-3/4" [197mm]

300 Open Trim with Socket Support



HOUSING / LAMP:
H71CAT: 65W BR30, 75W PAR30, 75W PAR30L
H71CT: 65W BR30, 75W PAR30, 75W PAR30L
H71R1CAT: 65W BR30, 75W PAR30, 75W PAR30L
H71R1CT: 65W BR30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 4" [102mm]; OD: 7-1/4" [184mm]

327 White Splay Trim



HOUSING / LAMP:
H71CAT: 65W BR30, 75W PAR30, 75W PAR30L
H71CT: 65W BR30, 75W PAR30, 75W PAR30L
H71R1CAT: 65W BR30, 75W PAR30, 75W PAR30L
H71R1CT: 65W BR30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 4-1/2" [101mm]; OD: 7-3/4" [197mm]

328 White Splay Trim



HOUSING / LAMP:
H71CAT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
H71CT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
H71R1CAT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
H71R1CT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 7-1/4" [197mm]

430 Wall Wash with Baffle and Full Reflector



HOUSING / LAMP:
H71CAT: 40W A19
H71CT: 40W A19
H71R1CAT: 40W A19
H71R1CT: 40W A19

 
DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

30 Super Trim™ AIR-TITE™ Reflector



30HAT White Trim with Haze Reflector
 30RGAT White Trim with Gold Reflector
 30CAT White Trim with Clear Specular Reflector




HOUSING / LAMP:
 H7ICATNB: 60W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 65W PAR38, 90W BR40
 H7ICTNB: 60W A19, 65W BR30, 65W PAR38, 75W PAR30, 75W R30, 75W PAR30L, 90W BR40

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

30SBAT Super Trim™ AIR-TITE™ Reflector



 30SBAT Black Specular Trim and Reflector




HOUSING / LAMP:
 H7ICATNB: 40W A19, 50W PAR30, 50W PAR38, 65W BR30, 75W PAR30L, 75W R30
 H7ICTNB: 40W A19, 50W PAR30, 50W PAR38, 65W BR30, 75W PAR30L, 75W R30

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

4041 Self Flanged White Reflector



4041P White Self Flanged Reflector

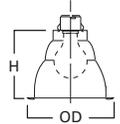


HOUSING / LAMP:
 H7ICATNB: 60W A19
 H7ICTNB: 60W A19

DIMENSIONS: Height: 5-1/4" [133mm]; OD: 7-1/4" [184mm]

404 Specular Reflector



 404C White Trim with Clear Specular Reflector
 404H White Trim with Haze Reflector
 404SN Satin Nickel Trim with Satin Nickel Reflector
 404TBZ Tuscan Bronze Trim with Tuscan Bronze Reflector
 404RG White Trim with Residential Gold Reflector




HOUSING / LAMP:
 H7ICATNB: 60W A19
 H7ICTNB: 60W A19

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

30 Super Trim™ AIR-TITE™ Baffle



 30WAT White Trim with White Baffle and White Reflector
 30WATH White Trim with White Baffle and Clear Reflector
 30PAT White Trim with Black Baffle and Clear Reflector
 30SNAT Satin Nickel Trim with Satin Nickel Baffle and Reflector
 30TBZAT Tuscan Bronze Trim with Tuscan Bronze Baffle and Reflector




HOUSING / LAMP:
 H7ICATNB: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 65W PAR38, 90W BR40
 H7ICTNB: 40W A19, 65W BR30, 65W PAR38, 75W PAR30, 75W R30, 75W PAR30L, 90W BR40

DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

78 Eyeball 30° Tilt



78P White Trim with White Eyeball
 78PAT White Trim with White Eyeball - AIR-TITE™ Trim
 78SN Satin Nickel Trim with Satin Nickel Eyeball
 78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball
 78B Satin Brass Trim with Satin Brass Eyeball
 78PB Polished Brass Trim with Polished Brass Eyeball

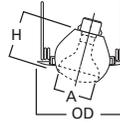


HOUSING / LAMP:
 H7ICATNB: 65W BR30, 75W R30, 75W PAR30L
 H7ICTNB: 65W BR30, 75W R30, 75W PAR30L

DIMENSIONS: Height: 4-1/8" [105mm]; Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

74 Eyeball 30° Tilt



 74P White Trim and Eyeball




HOUSING / LAMP:
 H7ICATNB: 75W PAR30
 H7ICTNB: 75W PAR30

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 8" [203mm]

77 Adjustable Eyeball 30° Tilt



 77P White Trim with White Eyeball




HOUSING / LAMP:
 H7ICATNB: 50W PAR20, 75W R20
 H7ICTNB: 50W PAR20, 75W R20

DIMENSIONS: Aperture: 2-3/4" [70mm]; OD: 8" [203mm]

76 Adjustable Gimbal 30° Tilt



76P White Trim with Gimbal Ring

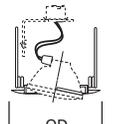

HOUSING / LAMP:
 H7ICATNB: 45W PAR38
 H7ICTNB: 45W PAR38

DIMENSIONS: OD: 8" [203mm], 30° tilt with screwbase lamp (50° tilt with side prong lamp where available)

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

376 Adjustable 30° Tilt



376W White Trim Ring
White Baffle

376P White Trim Ring
Black Baffle



HOUSING / LAMP:
H71CATNB: 50W PAR30, 50W PAR30L
H71CTNB: 50W PAR30, 50W PAR30L

DIMENSIONS: OD: 7-1/4" [184mm]

378 Adjustable with Splay 25° Tilt



378 White Trim with Clear
Specular Splay Trim

378P White Trim with
White Splay Trim



HOUSING / LAMP:
H71CATNB: 35W PAR30L
H71CTNB: 35W PAR30L

 
DIMENSIONS: OD: 7-1/4" [184mm]

478 Adjustable with Splay 25° Tilt



478P White Trim with
Opal Splay

478 White Trim with Clear
Specular Splay



HOUSING / LAMP:
H71CATNB: 45W PAR38
H71CTNB: 45W PAR38

DIMENSIONS: OD: 7-1/4" [184mm]


420 Regressed Eyeball 30° Tilt



420W White Trim with
White Eyeball and White
Baffle

420P White Trim with
White Eyeball and Black
Baffle

420PB Polished Brass
Trim with Polished Brass
Eyeball and Black Baffle

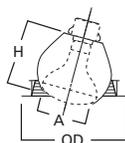

HOUSING / LAMP:
H71CATNB: 50W PAR30L, 50W PAR30, 60W BR30
H71CTNB: 50W PAR30L, 50W PAR30, 60W BR30

 
DIMENSIONS: Height: 3-15/16" [100mm]; Aperture: 4" [102mm];
OD: 7-1/4" [184mm]

170 Albalite Lens with Reflector



170P White Trim with
Frosted Albalite Glass Lens

170PS White Trim with
Frosted Albalite Glass Lens,
Wet Location, AIR-TITE™



HOUSING / LAMP:
H71CATNB: 40W A19
H71CTNB: 40W A19

 
DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

171 Drop Opal Lens with Reflector



171P White Trim with Drop
Opal Glass Lens

171PS White Trim with Drop
Opal Glass Lens,
Wet Location, AIR-TITE™



HOUSING / LAMP:
H71CATNB: 40W A19
H71CTNB: 40W A19

 
DIMENSIONS: Height: 4" [102mm]; OD: 8" [203mm]

173 Fresnel Lens with Reflector



173P White Trim with
Fresnel Glass Lens

173PS White Trim with
Fresnel Glass Lens, Wet
Location, AIR-TITE™



HOUSING / LAMP:
H71CATNB: 40W A19
H71CTNB: 40W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

 
172 Dome Lens with Reflector



172PS White Trim with
Frosted Glass Dome, Wet
Location, AIR-TITE™

172SNS Satin Nickel Trim
with Frosted Glass Dome,
Wet Location, AIR-TITE™

172TBZS Tuscan Bronze Trim
with Frosted Glass Dome,
Wet Location, AIR-TITE™



HOUSING / LAMP:
H71CATNB: 50W PAR30, 60W A19
H71CTNB: 50W PAR30, 60W A19

DIMENSIONS: Height: 2-1/8" [54mm]; OD: 7-3/4" [197mm]

 
300 Open Trim with Socket Support



300P White Trim

300SN Satin Nickel Trim

300TBZ Tuscan Bronze
Trim




HOUSING / LAMP:
H71CATNB: 65W BR30, 75W PAR30, 75W PAR30L
H71CTNB: 65W BR30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 4" [102mm]; OD: 7-1/4" [184mm]

327 White Splay Trim



 327P White Splay Trim
with socket support and
torsion springs



HOUSING / LAMP:
H71CATNB: 65W BR30, 75W PAR30,
75W PAR30L
H71CTNB: 65W BR30, 75W PAR30,
75W PAR30L

 
DIMENSIONS: Height: 4-1/2" [114mm]; OD: 7-3/4" [197mm]

430 Wall Wash with Baffle and Full Reflector



430W White Trim with
White Baffle, AIR-TITE™

430P White Trim with
Black Baffle, AIR-TITE™



HOUSING / LAMP:
H71CATNB: 40W A19
H71CTNB: 40W A19


DIMENSIONS: Height: 5" [127mm]; OD: 7-1/4" [184mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

78 Eyeball 30° Tilt



78P White Trim with White Eyeball
 78PAT White Trim with White Eyeball - AIR-TITE™ Trim
 78SN Satin Nickel Trim with Satin Nickel Eyeball
 78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball
 78B Satin Brass Trim with Satin Brass Eyeball
 78PB Polished Brass Trim with Polished Brass Eyeball

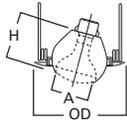


HOUSING / LAMP:
 H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
 H7T: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
 H7TNB: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
 H7TCP: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 4-1/8" [105mm];
 Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

410 Coilex® Baffle



 410W White Trim with White Baffle (410WG White Trim with White Baffle 8in OD Trim Ring)
 410P White Trim with Black Baffle




HOUSING / LAMP:
 H7RT: 120W BR40, 150W R40
 H7T: 150W PAR38, 120W BR40, 150W R40
 H7TCP: 150W PAR38, 120W BR40, 150W R40

DIMENSIONS: Height: 2-3/4" [70mm]; OD: 7-1/4" [184mm]

353 Metal Baffle



 353SN Satin Nickel Trim with Satin Nickel Baffle
 353TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle




HOUSING / LAMP:
 H7RT: 65W BR30, 75W PAR30, 75W R30
 H7T: 65W BR30, 75W PAR30, 75W R30
 H7TCP: 65W BR30, 75W PAR30, 75W R30

DIMENSIONS: Height: 3" [76mm]; OD: 7-1/4" [184mm]

312 Coilex® Baffle



 312W White Trim with White Baffle
 312P White Trim with Black Baffle




HOUSING / LAMP:
 H7RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
 H7T: 65W BR30, 75W R30, 75W PAR30
 H7TCP: 65W BR30, 75W R30, 75W PAR30

DIMENSIONS: Height: 2-1/4" [57mm]; OD: 7-1/4" [184mm]

74 Eyeball 30° Tilt



 74P White Trim and Eyeball




HOUSING / LAMP:
 H7RT: 75W PAR30
 H7T: 75W PAR30
 H7TNB: 75W PAR30
 H7TCP: 75W PAR30

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 8" [203mm]

76 Adjustable Gimbal 30° Tilt



 76P White Trim with Gimbal Ring




HOUSING / LAMP:
 H7RT: 150W PAR38
 Side Prong Lamp recommended
 H7T: 150W PAR38
 Side Prong Lamp recommended
 H7TNB: 150W PAR38 Side Prong Lamp recommended
 H7TCP: 150W PAR38 Side Prong Lamp recommended

DIMENSIONS: OD: 8" [203mm], 30° tilt with side prong lamp (50° tilt with screwbase lamp)

77 Adjustable Eyeball 30° Tilt



 77P White Trim with White Eyeball




HOUSING / LAMP:
 H7RT: 50W R20, 50W PAR20
 H7T: 50W R20, 50W PAR20
 H7TNB: 50W R20, 50W PAR20
 H7TCP: 50W R20, 50W PAR20

DIMENSIONS: Aperture: 2-3/4" [70mm]; OD: 8" [203mm]

90 Double Bubble Adjustable 60° Tilt



 90P White Trim and Eyeball



HOUSING / LAMP:
 H7RT: 250W PAR38
 H7T: 250W PAR38
 H7TCP: 250W PAR38

DIMENSIONS: OD: 8" [203mm]

376 Adjustable 30° Tilt



376W White Trim Ring with White Baffle
 376P White Trim Ring with Black Baffle



HOUSING / LAMP:
 H7RT: 50W PAR30
 H7T: 75W PAR30
 H7TNB: 75W PAR30
 H7TCP: 75W PAR30

DIMENSIONS: OD: 7-1/4" [184mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

378 Adjustable with Splay 25° Tilt

 


HOUSING / LAMP:

H7RT: 75W PAR30
H7T: 75W PAR30
H7TNB: 75W PAR30
H7TCP: 75W PAR30

DIMENSIONS: OD: 7-1/4" [184mm]

478 Adjustable with Splay 25° Tilt




HOUSING / LAMP:

H7RT: 150W PAR38
H7T: 90W PAR38
H7TNB: 90W PAR38
H7TCP: 90W PAR38

DIMENSIONS: OD: 7-1/4" [184mm]

417 Coilex® Baffle Eyeball 30° Tilt

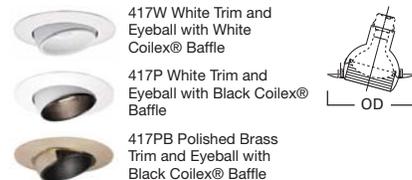


HOUSING / LAMP:

H7RT: 65W BR30, 75W R30
H7T: 65W BR30, 75W R30
H7TNB: 65W BR30, 75W R30
H7TCP: 65W BR30, 75W R30

DIMENSIONS: OD: 8" [203mm]

 419P Regressed Eyeball with Splay 25° Tilt



HOUSING / LAMP:

H7RT: 75W PAR30
H7T: 75W PAR30
H7TNB: 75W PAR30
H7TCP: 75W PAR30

DIMENSIONS: OD: 7-1/4" [184mm]

420 Regressed Eyeball 30° Tilt




HOUSING / LAMP:

H7ICAT: 50W PAR30L, 50W PAR30, 60W BR30
H7ICT: 50W PAR30L, 50W PAR30, 60W BR30
H7RICAT: 50W PAR30L, 50W PAR30, 60W BR30
H7RICT: 50W PAR30L, 50W PAR30, 60W BR30

DIMENSIONS: Height: 3-15/16" [100mm]; Aperture: 4" [102mm];
OD: 7-1/4" [184mm]

70 Albalite Lens

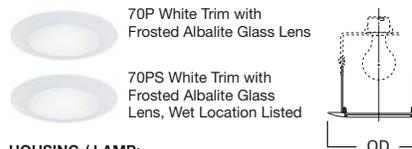

HOUSING / LAMP:

H7RT: 60W A19
H7T: 60W A19
H7TCP: 60W A19

DIMENSIONS: OD: 8" [203mm]

170 Albalite Lens with Reflector




HOUSING / LAMP:

H7TNB: 60W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

71 Drop Opal Lens

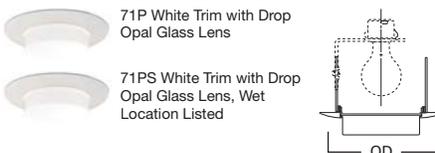

HOUSING / LAMP:

H7RT: 60W A19
H7T: 60W A19
H7TCP: 60W A19

DIMENSIONS: OD: 8" [203mm]

171 Drop Opal Lens with Reflector



HOUSING / LAMP:

H7TNB: 60W A19

DIMENSIONS: Height: 4" [102mm]; OD: 8" [203mm]

426 Reflector Cone



426 White Trim Ring with Clear Specular Reflector Cone



426MB White Trim with Specular Black Reflector Cone



426H White Trim with Haze Reflector Cone



426SN Satin Nickel Trim with Satin Nickel Reflector Cone




426TBZ Tuscan Bronze Trim with Tuscan Bronze Reflector Cone



426RG White Trim with Residential Gold Reflector Cone



426CG White Trim with Champagne Gold Reflector Cone

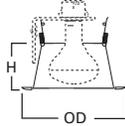

HOUSING / LAMP:

H271CAT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, 75W PAR30
 H271CT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, 75W PAR30
 H271CAT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L
 H271RCT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L

DIMENSIONS: Height: 2-1/16" [68mm]; OD: 7-1/4" [184mm]

310 Coilex® Baffle



310W White Trim with White Coilex® Baffle



310P White Trim with Black Coilex® Baffle



310SN Satin Nickel Trim with Black Coilex® Baffle



 
310TBZ Tuscan Bronze Trim with Black Coilex® Baffle



310WG Wide White Trim Ring with White Coilex® Baffle



310PG Wide White Trim Ring with Black Coilex® Baffle



HOUSING / LAMP:

H271CAT: 50W PAR30, 65W BR30, 75W PAR30L
 H271CT: 50W PAR30, 65W BR30, 75W PAR30L
 H271CAT: 50W PAR30, 65W BR30, 75W PAR30L
 H271RCT: 50W PAR30, 65W BR30, 75W PAR30L

DIMENSIONS: 310W, P, SN, TBZ

H: 3-1/16" [78mm]
 OD: 7-1/4" [184mm]
 310WG, PG
 H: 3-1/16" [78mm]
 OD: 8" [203mm]


312 Coilex® Baffle



312W White Trim with White Coilex® Baffle



312P White Trim with Black Coilex® Baffle

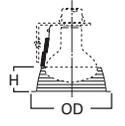

HOUSING / LAMP:

H271CAT: 50W PAR30, 65W BR30
 H271CT: 50W PAR30, 65W BR30
 H271CAT: 50W PAR30, 65W BR30
 H271RCT: 50W PAR30, 65W BR30

DIMENSIONS: Height: 2-1/4" [57mm]; OD: 7-1/4" [184mm]

 
353 Metal Baffle



353SN Satin Nickel Trim with Satin Nickel Baffle



353TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle



HOUSING / LAMP:

 
H271CAT: 50W PAR30, 65W BR30, 75W PAR30L
 H271CT: 50W PAR30, 65W BR30, 75W PAR30L
 H271CAT: 50W PAR30, 65W BR30, 75W PAR30L
 H271RCT: 50W PAR30, 65W BR30, 75W PAR30L

DIMENSIONS: Height: 3" [76mm]; OD: 7-1/4" [184mm]

74 Eyeball 30° Tilt



74P White Trim and Eyeball



HOUSING / LAMP:


H271CAT: 75W PAR30
 H271CT: 75W PAR30
 H271CAT: 75W PAR30
 H271RCT: 75W PAR30

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 8" [203mm]

77 Adjustable Eyeball 30° Tilt



77P White Trim with White Eyeball

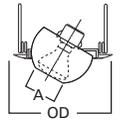

HOUSING / LAMP:

H271CAT: 50W PAR20, 75W R20
 H271CT: 50W PAR20, 75W R20
 H271CAT: 50W PAR20, 75W R20
 H271RCT: 50W PAR20, 75W R20

DIMENSIONS: Aperture: 2-3/4" [70mm]; OD: 8" [203mm]

78 Eyeball 30° Tilt



78P White Trim with White Eyeball



78PAT White Trim with White Eyeball - AIR-TITE™ Trim



78SN Satin Nickel Trim with Satin Nickel Eyeball




78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball



78B Satin Brass Trim with Satin Brass Eyeball



78PB Polished Brass Trim with Polished Brass Eyeball

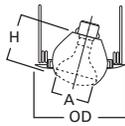

HOUSING / LAMP:

H271CAT: 65W BR30, 75W PAR30L, 75W R30
 H271CT: 65W BR30, 75W PAR30L, 75W R30
 H271CAT: 65W BR30, 75W PAR30L, 75W R30
 H271RCT: 65W BR30, 75W PAR30L, 75W R30

DIMENSIONS: Height: 4-1/8" [105mm];
 Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

420 Regressed Eyeball 30° Tilt



 
420W White Trim with White Eyeball and White Baffle



420P White Trim with White Eyeball and Black Baffle



420PB Polished Brass Trim with Polished Brass Eyeball and Black Baffle



HOUSING / LAMP:


H7UICAT: 65W BR30, 75W PAR30L, 75W PAR30
 H7UICT: 65W BR30, 75W PAR30L, 75W PAR30

DIMENSIONS: Height: 3-15/16" [100mm]; Aperture: 4" [102mm];
 OD: 7-1/4" [184mm]

90 Double Bubble Adjustable 60° Tilt



90P White Trim and Eyeball

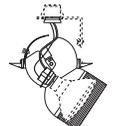


HOUSING / LAMP:

H271CAT: 150W PAR38
 H271CT: 150W PAR38
 H271CAT: 150W PAR38
 H271RCT: 150W PAR38

DIMENSIONS: OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

 170 Albalite Lens with Reflector



HOUSING / LAMP:
 H271CAT: 35W PAR30L
 H271CT: 35W PAR30L
 H271RICAT: 40W A19
 H271RICT: 40W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

171 Drop Opal Lens with Reflector



HOUSING / LAMP:
 H271CAT: 40W A19
 H271CT: 40W A19
 H271RICAT: 40W A19
 H271RICT: 40W A19

DIMENSIONS: Height: 4" [102mm]; OD: 8" [203mm]

172 Dome Lens with Reflector



HOUSING / LAMP:
 H271CAT: 50W PAR30, 60W A19
 H271CT: 50W PAR30, 60W A19
 H271RICAT: 50W PAR30, 60W A19
 H271RICT: 50W PAR30, 60W A19

DIMENSIONS: Height: 2-1/8" [54mm]; OD: 7-3/4" [197mm]

300 Open Trim with Socket Support



HOUSING / LAMP:
 H271CAT: 50W PAR30L, 60W BR30, 75W PAR30
 H271CT: 50W PAR30L, 60W BR30, 75W PAR30
 H271RICAT: 60W BR30, 75W PAR30
 H271RICT: 60W BR30, 75W PAR30

DIMENSIONS: Height: 4" [102mm]; OD: 7-1/4" [184mm]

328 White Splay Trim




HOUSING / LAMP:
 H271CAT: 65W BR30, 75W PAR30, 75W PAR30L
 H271CT: 65W BR30, 75W PAR30, 75W PAR30L
 H271RICAT: 50W PAR30, 65W BR30, 75W PAR30L
 H271RICT: 50W PAR30, 65W BR30, 75W PAR30L

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 7-3/4" [197mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

426 Reflector Cone

-  426 White Trim Ring with Clear Specular Reflector Cone
-  426MB White Trim with Specular Black Reflector Cone
-  426H White Trim with Haze Reflector Cone
-  426SN Satin Nickel Trim with Satin Nickel Reflector Cone
-  426TBZ Tuscan Bronze Trim with Tuscan Bronze Reflector Cone
-  426RG White Trim with Residential Gold Reflector Cone
-  426CG White Trim with Champagne Gold Reflector Cone

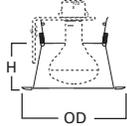


HOUSING / LAMP:
H27RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30

DIMENSIONS: Height: 2-11/16" [68mm]; OD: 7-1/4" [184mm]

310 Coilex® Baffle

 -  310W White Trim with White Coilex® Baffle
-  310P White Trim with Black Coilex® Baffle
-  310SN Satin Nickel Trim with Black Coilex® Baffle
-  310TBZ Tuscan Bronze Trim with Black Coilex® Baffle
-  310WG Wide White Trim Ring with White Coilex® Baffle
-  310PG Wide White Trim Ring with Black Coilex® Baffle




HOUSING / LAMP:
H27RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: 310W, P, SN, TBZ
H: 3-1/16" [78mm]
OD: 7-1/4" [184mm]
310WG, PG
H: 3-1/16" [78mm]
OD: 8" [203mm]

78 Eyeball 30° Tilt

-  78P White Trim with White Eyeball
-  78PAT White Trim with White Eyeball - AIR-TITE™ Trim
-  78SN Satin Nickel Trim with Satin Nickel Eyeball
-  78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball
-  78B Satin Brass Trim with Satin Brass Eyeball
-  78PB Polished Brass Trim with Polished Brass Eyeball

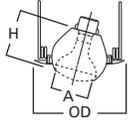


HOUSING / LAMP:
H27RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 4-1/8" [105mm];
Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

4261 Self Flange White Reflector Cone

-  4261P White Self Flanged Reflector Cone

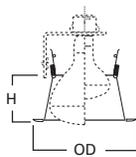


HOUSING / LAMP:
H27RT: 75WR30, 75W PAR30, 75W PAR30L
H27T: 100W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 2-5/8" [67mm];
OD: 7-1/4" [184mm]

312 Coilex® Baffle

 -  312W White Trim with White Baffle
-  312P White Trim with Black Baffle




HOUSING / LAMP:
H27RT: 75W PAR30, 75W PAR30L, 85W BR30
H27T: 85W BR30, 75W PAR30

DIMENSIONS: Height: 2-1/4" [57mm]; OD: 7-1/4" [184mm]

353 Metal Baffle

-  353SN Satin Nickel Trim with Satin Nickel Baffle
-  353TBZ Tuscan Bronze Trim with Tuscan Bronze Baffle

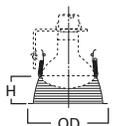


HOUSING / LAMP:
H27RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
H27T: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: Height: 3" [76mm]; OD: 7-1/4" [184mm]

74 Eyeball 30° Tilt

 -  74P White Trim and Eyeball




HOUSING / LAMP:
H27RT: 75W PAR30
H27T: 75W PAR30

DIMENSIONS: Height: 3-7/8" [98mm]; OD: 8" [203mm]

77 Adjustable Eyeball 30° Tilt

 -  77P White Trim with White Eyeball




HOUSING / LAMP:
H27RT: 50W R20, 50W PAR20
H27T: 50W R20, 50W PAR20

DIMENSIONS: Aperture: 2-3/4" [70mm]; OD: 8" [203mm]

90 Double Bubble Adjustable 60° Tilt

 -  90P White Trim and Eyeball




HOUSING / LAMP:
H27T: 250W PAR38

DIMENSIONS: OD: 8" [203mm]

376 Adjustable 30° Tilt

 -  376W White Trim Ring White Baffle
-  376P White Trim Ring Black Baffle



HOUSING / LAMP:
H27RT: 75W PAR30
H27T: 75W PAR30

DIMENSIONS: OD: 7-1/4" [184mm]

378 Adjustable with Splay 25° Tilt

-  378 White Trim with Clear Specular Splay Trim
-  378P White Trim with White Splay Trim



HOUSING / LAMP:
H27RT: 75W PAR30
H27T: 75W PAR30

DIMENSIONS: OD: 7-1/4" [184mm]

419 Regressed Eyeball with Splay 25° Tilt

-  419P White Trim and Eyeball with White Splay



HOUSING / LAMP:
H27RT: 75W PAR30
H27T: 75W PAR30


DIMENSIONS: OD: 7-1/4" [184mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

420 Regressed Eyeball 30° Tilt



420W White Trim with White Eyeball and White Baffle
 420P White Trim with White Eyeball and Black Baffle
 420PB Polished Brass Trim with Polished Brass Eyeball and Black Baffle

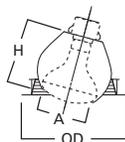


HOUSING / LAMP:
 H27RT: 75W BR30, 75W PAR30L, 75W PAR30
 H27T: 75W BR30, 75W PAR30L, 75W PAR30

DIMENSIONS: Height: 3-15/16" [100mm]; Aperture: 4" [102mm];
 OD: 7-1/4" [184mm]

70 Albalite Lens



 70P White Trim with Frosted Albalite Glass Lens
 70PS White Trim with Frosted Albalite Glass Lens, Wet Location Listed




HOUSING / LAMP:
 H27T: 60W A19

DIMENSIONS: OD: 8" [203mm]

170 Albalite Lens with Reflector



 170P White Trim with Frosted Albalite Glass Lens
 170PS White Trim with Frosted Albalite Glass Lens, Wet Location, AIR-TITE™




HOUSING / LAMP:
 H27RT: 60W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

71 Drop Opal Lens



71P White Trim with Drop Opal Glass Lens
 71PS White Trim with Drop Opal Glass Lens, Wet Location Listed

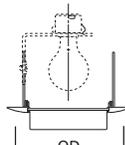


HOUSING / LAMP:
 H27T: 60W A19

DIMENSIONS: OD: 8" [203mm]

171 Drop Opal Lens with Reflector



171P White Trim with Drop Opal Glass Lens
 171PS White Trim with Drop Opal Glass Lens, Wet Location, AIR-TITE™

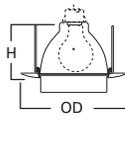


HOUSING / LAMP:
 H27RT: 60W A19

DIMENSIONS: Height: 4" [102mm]; OD: 8" [203mm]

73 Fresnel Lens



73P White Trim with Fresnel Glass Lens
 73PS White Trim with Fresnel Glass Lens, Wet Location, AIR-TITE™

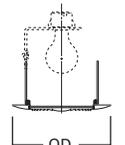


HOUSING / LAMP:
 H27T: 40W A19

DIMENSIONS: OD: 8" [203mm]

173 Fresnel Lens with Reflector



 173P White Trim with Fresnel Glass Lens
 173PS White Trim with Fresnel Glass Lens, Wet Location, AIR-TITE™




HOUSING / LAMP:
 H27RT: 60W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

75 Diffuser



 75 All Glass Diffuser




HOUSING / LAMP:
 H27T: 60W A19

DIMENSIONS: OD: 7-3/4" [197mm]

328 White Splay Trim



328P White Splay Trim

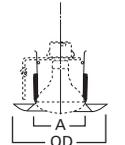


HOUSING / LAMP:
 H27RT: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30
 H27T: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30

DIMENSIONS: Height: 3-7/8" [98mm];
 OD: 7-3/4" [197mm]

172 Dome Lens with Reflector



 172PS White Trim with Frosted Glass Dome, Wet Location, AIR-TITE™
 172SNS Satin Nickel Trim with Frosted Glass Dome, Wet Location, AIR-TITE™
 172TBZS Tuscan Bronze Trim with Frosted Glass Dome, Wet Location, AIR-TITE™




HOUSING / LAMP:
 H27RT: 75W PAR30, 100W A19
 H27T: 75W PAR30, 100W A19

DIMENSIONS: Height: 2-1/8" [54mm]; OD: 7-3/4" [197mm]

301 Open Trim



 301P White Trim
 301SN Satin Nickel Trim
 301TBZ Tuscan Bronze Trim
 301PB Polished Brass Trim




HOUSING / LAMP:
 H27RT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L
 H27T: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

DIMENSIONS: OD: 7-1/4" [184mm]

79 Pinhole Trim



 79P White Trim



HOUSING / LAMP:
 H27RT: 50W PAR30
 H27T: 75W PAR30

DIMENSIONS: OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

6-INCH INCANDESCENT SLOPE CEILING HOUSING NON - IC



 

H47T

FEATURES

- Got Nail™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing and plaster frame
- Socket aiming for ceilings from 2/12 to 6/12 pitch
- Slope indicator provides quick and consistent lamp settings
- Telescoping housing adjusts deeper for sharper lamp cutoff

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

COMPLIANCES: UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated

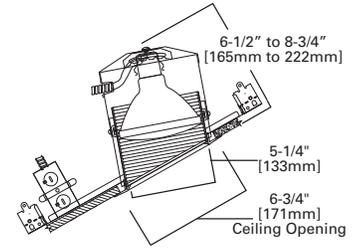


ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY^Δ

SAMPLE NUMBER: H47T - 498W

Housing	Trims
<p>H47T=6" Aperture, New Construction, Slope Ceiling, Non-IC, 120V Line Voltage</p>	<p>Adjustables</p> <p>1417 Low Voltage Eyeball with Baffle - 30° Tilt, 50W 12V MR16, OD: 7-1/4" [184mm] 1417BA=White Trim with White Eyeball and Black Baffle (Low Voltage Transformer Included) 1417W=White Trim with White Eyeball and White Baffle (Low Voltage Transformer Included)</p> <p>417 Coilex® Baffle Eyeball - 30° Tilt, 65W BR30, 75W R30, OD: 8" [203mm] 417P=White Trim and Eyeball with Black Coilex® Baffle 417PB=Polished Brass Trim and Eyeball with Black Coilex® Baffle 417W=White Trim and Eyeball with White Coilex® Baffle</p> <p>78 Eyeball - 30° Tilt, 65W BR30, 75W R30, OD: 8" [203mm] 78B=Satin Brass Trim with Satin Brass Eyeball 78P=White Trim with White Eyeball 78PAT=White Trim with White Eyeball - AIR-TITE™ Trim 78PB=Polished Brass Trim with Polished Brass Eyeball 78SN=Satin Nickel Trim with Satin Nickel Eyeball 78TBZ=Tuscan Bronze Trim with Tuscan Bronze Eyeball</p> <p>Baffles</p> <p>496 Baffle, 100W A19, 150W A21, OD: 7-7/8" [200mm] 496P=White Trim with Black Baffle and Reflector 496W=White Trim with White Baffle and Reflector</p> <p>498 Baffle, 90W PAR38, 150W PAR38, 150W R40, OD: 7-7/8" [200mm] 498P=White Trim with Black Baffle 498W=White Trim with White Baffle</p> <p>Lenses and Diffusers</p> <p>170 Albalite Lens with Reflector, 60W A19, OD: 8" [203mm] 170P=White Trim with Frosted Albalite Glass Lens 170PS=White Trim with Frosted Albalite Glass Lens, Wet Location Listed and AIR-TITE™</p>

NOTES: Δ UL/cUL Listed for Wet Location with select trims.

PITCH TO DEGREE CONVERSION

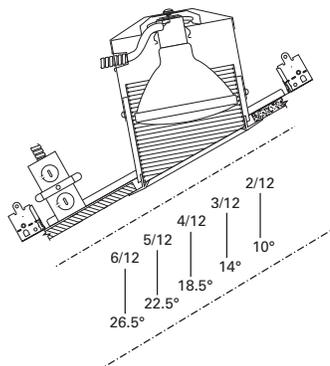


Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.

498 Slope Ceiling Baffle



498W White Trim with White Baffle
498P White Trim with Black Baffle

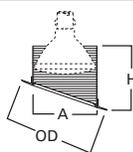

HOUSING / LAMP:


H471CAT: 90W PAR38
H471CT: 90W PAR38
H47T: 90W PAR38, 150W PAR38, 150W R40

DIMENSIONS: Height: 5-1/2" [140mm]; Aperture: 5-1/4" [133mm]; OD: 7-7/8" [200mm]

496 Slope Ceiling Baffle



496W White Trim with White Baffle and Reflector
496P White Trim with Black Baffle and Reflector

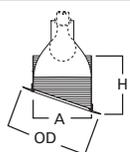

HOUSING / LAMP:


H471CAT: 75W A19, 100W R30, 85W BR30, 75W PAR30L
H471CT: 75W A19, 100W R30, 85W BR30, 75W PAR30L
H47T: 100W A19, 150W A21

DIMENSIONS: Height: 5-1/2" [140mm]; Aperture: 5-1/4" [133mm]; OD: 7-7/8" [200mm]

78 Eyeball 30° Tilt



78P White Trim with White Eyeball
78PAT White Trim with White Eyeball - AIR-TITE™ Trim
78SN Satin Nickel Trim with Satin Nickel Eyeball
78TBZ Tuscan Bronze Trim with Tuscan Bronze Eyeball
78B Satin Brass Trim with Satin Brass Eyeball
78PB Polished Brass Trim with Polished Brass Eyeball

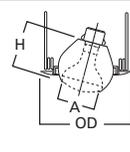

HOUSING / LAMP:

 
H471CAT: 65W BR30, 75W R30
H471CT: 65W BR30, 75W R30
H47T: 65W BR30, 75W R30

DIMENSIONS: Height: 4-1/8" [105mm]; Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

170 Albalite Glass Lens with Reflector



170P White Trim with Frosted Albalite Glass Lens
170PS White Trim with Frosted Albalite Glass Lens, Wet Location, AIR-TITE™



HOUSING / LAMP:

H471CAT: 60W A19
H471CT: 60W A19
H47T: 60W A19

DIMENSIONS: Height: 4" [101mm]; OD: 8" [203mm]

417 Coilex® Baffle Eyeball 30° Tilt



417W White Trim and Eyeball with White Coilex Baffle
417P White Trim and Eyeball with Black Coilex Baffle
417PB Polished Brass Trim and Eyeball with Black Coilex Baffle



HOUSING / LAMP:

H471CAT: 65W BR30, 75W R30
H471CT: 65W BR30, 75W R30
H47T: 65W BR30, 75W R30

DIMENSIONS: OD: 8" [203mm]

1417 Low Voltage Eyeball with Baffle 30° Tilt



1417W White Trim with White Eyeball and White Baffle
1417BA White Trim with White Eyeball and Black Baffle



HOUSING / LAMP:

H471CAT: 20W 12V MR16
H471CT: 20W 12V MR16
H47T: 50W 12V MR16

DIMENSIONS: OD: 7-1/4" [184mm]

ACCESSORIES: Low Voltage Transformer Included

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.