

Liquidtight Flexible Non-Metallic Conduit & Fittings

T&B Catalog Number:

LT43G

UPC Number:

03448108565

Status:

Active

Description:

1-1/4 Inch, Straight, Two-Piece Liquidtight Non-Metallic Fitting, UL E32447, Temperatures up to 107 Degrees C, Nitril Rubber O-Ring, PVC, Grey

Features

Non-conductive and non-corrosive.

Resistant to oil, acid, ozone and alkaline.

Easy to install.

Approved for indoor and outdoor locations

UL listed for wet locations

Nitrile rubber 'O' ring for a liquidtight termination.

Temperatures up to 225 degree F (107 degree C)

Meets UL standard 514B.

Application

For use with Carflex conduit and Carflex X-Flex conduit.

General

Trade Size (inches)

1 1/4

Material

Non-Metallic

Dimension Information

Size (inches)

1 1/4

Degree of Bend

Straight

A (inches)

0.71

B (inches)

1.16

C (inches)

2.5

D (inches)

2.17

E (inches)

2.04

Packaging

T&B Order Multiple

5

Package in Units

5

T&B Sold in UOM

Each

T&B Weight Per UOM

0.27 lbs. Each

Application Support

T&B Sales Drawings

wsd-ac02107

Product Overview-Carflex Liquidtight Flex-Available on Website

ible Tubing

Certifications

RoHS Compliance


No

Certifications



File Nbr:

E 32447

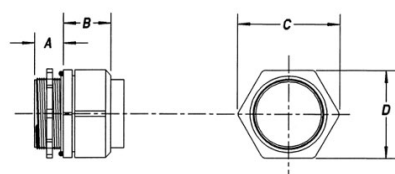

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com