

Straight Blade Devices  
15A, 125V, 2 Pole, 3 Wire Grounding  
Miscellaneous Receptacles



Ordering Information

Description	Device Color	UPC	Catalog Number
Receptacle, display type, brown phenolic, blank flush plug	Brown	783585013787	HBL5236

Listings


UL Listed to UL498 File E2186
Certified to CSA, C22.2, No. 42 file 285
NEMA® WD-6 Compliant

Specifications

Face	Phenolic
Base	Phenolic
Power Contacts	.032" (.81) Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device
Terminal Accommodation	#14-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
<b>Environmental</b>	
Flammability	UL 94 V-2 or better
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

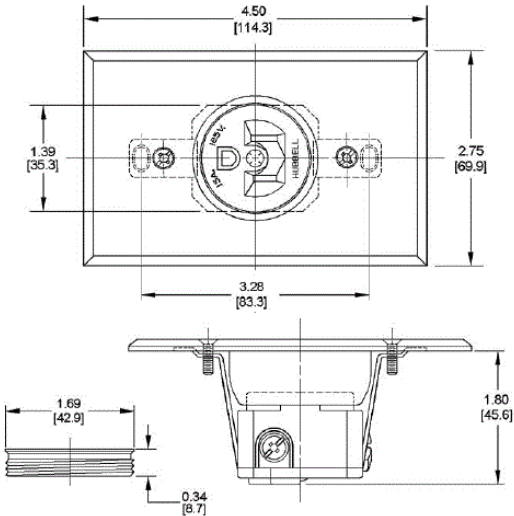

Resources

Customer Use Drawing
eCatalog

