


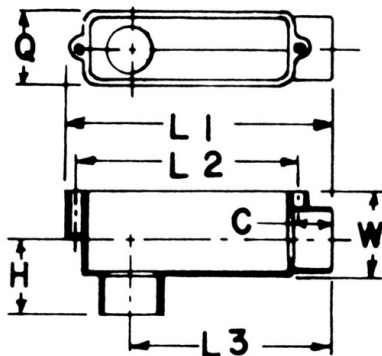

Rigid Non-Metallic Conduit Bodies & Covers

T&B Catalog Number:

E986F-CAR

UPC Number:

03448113250

Status:

Active

Description:

Type LB Conduit Body, Volume 12 Cubic Inches, Size 1 Inch, Length 5-9/32 Inches, Width 1-3/4 Inches, Material PVC, Color Gray, For use with Schedule 40 and 80 Conduit, Pack of 10

Features

Textured lids

Foam-in-place gasket

Application

For use with Rigid Conduit

General

Trade Size (inches)	1
Material	Non-Metallic
Volume (cu.in.)	12
Conduit Body Shape	LB

Dimension Information

C (inches)	29/32
H (inches)	1 25/32
L1 (inches)	6 9/32
L2 (inches)	5 9/32
L3 (inches)	4 25/32
Q (inches)	1 3/4
W (inches)	2 1/32

Packaging

T&B Order Multiple	10
Package in Units	10
T&B Sold in UOM	Each
T&B Weight Per UOM	39.88 lbs. per 100

Application Support

T&B Sales Drawings	wsd-ac05071
Rigid Non-metallic Conduit Bodies	Available on Website
Specifications & Applications	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:

E11461

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com