

40W DIMMABLE MAGNETIC DRIVER

INDOOR & OUTDOOR DIMMABLE MAGNETIC CLASS 2 LED DRIVER
PART # DR-40W-24VDC-DIM

LEDI

Specification Sheet


Dimmable

24V
DC

Class
2




The 40W Dimmable Magnetic Driver is the most compact LED driver on the market with a magnetic transformer core. It is equipped with two auto-reset breakers, one on the input and one on the output, which protect both the load and driver. The driver is encased in a coated metal box that includes 2 knock-outs, one on each side, to enable easy installation that complies with electrical code requirements.

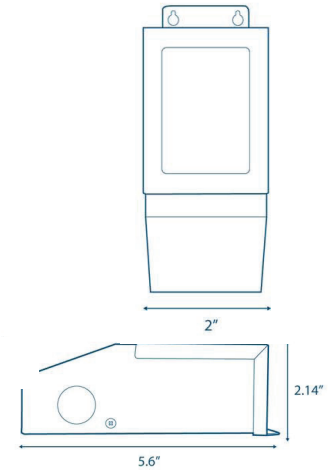

Specifications

Input Voltage	120V AC
Output Voltage	24V DC
Max Load	40W
Recommended Min. Load	28W
Absolute Min. Load	20W
Max Operating Temp. *	160°F
Avg. Efficiency	82%
Dimming	MLV**
Input Current Full Load	410 mA
Output Voltage Full Load	22.3V DC
Max Output Current Full Load	1.72 A
Open Circuit Output Voltage	24.5V DC
Circuit Breaker	Primary and Secondary Auto Reset
Dimensions LxWxH	5-5/8" x 2" x 2-3/16"
Weight	35 Oz.
Ratings	Class 2 and NEMA-3R
Certifications	UL, ETL

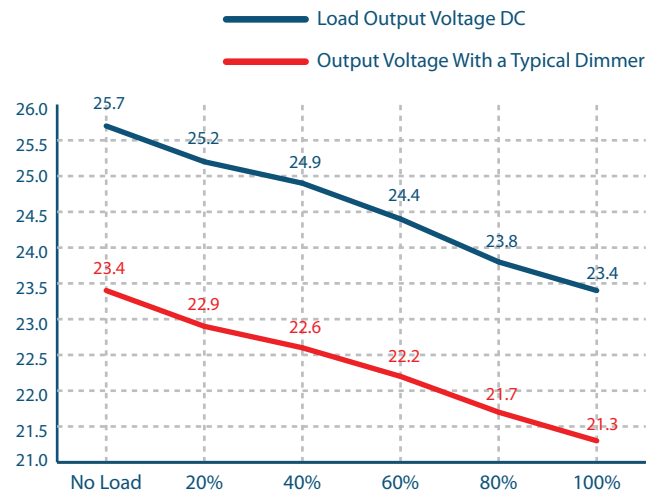

*When installed with proper ventilation. ** See our Dimmer Compatibility List

FEATURES:

- ✓ Dimmable with most quality Magnetic Low-Voltage dimmers
- ✓ Dual protection-primary and secondary auto-reset circuit breakers
- ✓ Nema 3R Enclosed-Outdoor Use
- ✓ Two knock-outs one on each side
- ✓ Class 2
- ✓ ETL Listed
- ✓ CSA Listed

