




4 IN. OCTAGON DRAWN DEEP BOXES WITH CONDUIT KO'S

4 in. Octagon Box, 2-1/8" Deep - Drawn with Conduit KO's

A39

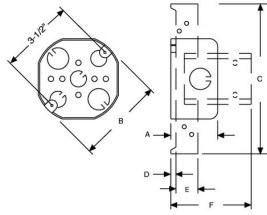

Catalog #: 167

APPLICATIONS

RACO® Octagon Boxes are used in the installation of ceiling or wall lighting fixtures
N/A

PRODUCT FEATURES

Combination screw heads provide for faster installation

UL LISTED

File E195978

COMPLIANCES

MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

Wiring System: Conduit
Country of Origin: USA

RECOMMENDED MAX LOAD

Ceiling Fan (Dynamic) Lbs.: No
Fixture (Static) Lbs.: 50

CONFIGURATION

Bracket Type: No Bracket
Drawn or Welded: Drawn
Raised Ground: No
Side Knockout(s): (2) 1/2 in. & (2) 3/4 in.
Bottom Knockouts(s): (3) 1/2 in. & (2) 3/4 in.

DRAWING DIMENSIONS

Dimension A: 2-1/8 in.
Dimension B: 4 in.

PRODUCT MEASUREMENTS

Depth: 2-1/8 in.
Cubic Inches (cm3): 21.5 (352.3)
Wt. Ea. (Lbs.): 0.624
Product Length (in.): 2.19
Product Width (in.): 4.00
Product Height (in.): 4.00

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 62.40
Ship Carton Length (in.): 11.13
Ship Carton Width (in.): 8.75
Ship Carton Height (in.): 10.63
Ctn Weight (Lbs.): 15.60
Pallet Qty: 2000
UPC Number: 050169001677
I2of5: 40050169001675