


LINE VOLTAGE WALL MOUNTED THERMOSTATS



SERIES 2000 THERMOSTATS

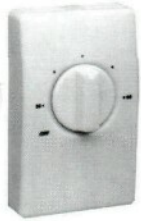

- Single & Double Pole designs
- Optional wire leads, or screw terminals
- Double pole models incorporate positive off
- Two stage model is available by special order

UPC 686334	MODEL	Color	DESCRIPTION	LIST
502849	S2022H10AA	White	Single Pole with leads, 22 amp	17.75
502436	S2022H10AB	Ivory	Single Pole with leads, 22 amp	17.75
502658	S2022H10AC	White	Single Pole with terminals, 22 amp	14.00
502665	S2022H10AD	Ivory	Single Pole with terminals, 22 amp	14.00
502948	S2022H10EC	White	Single Pole with terminals, 22 amp, 40-80oF	15.25
502856	D2022H10BA	White	Double Pole with leads, 22 amp	24.50
502443	D2022H10BB	Ivory	Double Pole with leads, 22 amp	24.50
502672	D2022H10BC	White	Double Pole with terminals, 22 amp	17.50
502689	D2022H10BD	Ivory	Double Pole with terminals, 22 amp	17.50
501439	2000 Knob/Cover	White	Replacement Knob/Cover for 1A S.P.	6
501446	2000 Knob/Cover	White	Replacement Knob/Cover for 1D D.P.	6

MASTER PACK: 25 Pieces / 12 lbs.



TW SERIES THERMOSTATS



- Single & Double Pole designs
- Wire leads
- Double pole models incorporate positive off
- TW141 / TW142 available in woodgrain finish by special order

UPC 686334	MODEL	Color	DESCRIPTION	LIST
260985	TW141 (1A22-3)*	Beige	Single Pole 22 amp @ 120-240v, 18 amp@277	17.25
260992	TW142 (1D22-3)*	Beige	Double Pole 22 amp @ 120-240v, 18 amp@277	21.75
500661	TW241(25 / case)	Beige	Single Pole 22 amp @ 120-240v, 18 amp@277	18.00
500678	TW242 (25 / case)	Beige	Double Pole 22 amp @ 120-240v, 18 amp@277	23.50
500814	TW141-3 (1A22-6)*	White	Single Pole 22 amp @ 120-240v, 18 amp@277	17.25
500821	TW142-3 (1D22-6)*	White	Double Pole 22 amp @ 120-240v, 18 amp@277	21.75
261043	TW143	Beige	Single Pole 22 amp @ 120-240v, 18 amp@277 75 °F Max	19.00
261050	TW144	Beige	Double Pole version of TW143	24.50
502009	TW145 (T1A22-3)*	Beige	Single Pole 22 amp @ 120-240v, 18 amp@277 Tamper Resistant	39.00
502016	TW146 (T1D22-3)*	Beige	Double Pole version of TW145	46.00
502023	TW147	Beige	Single Pole 25 amp @ 120-240v, 18 amp@277	29.00
502030	TW148	Beige	Double Pole 25 amp @ 120-240v, 18 amp@277	39.00
502047	TW150(2 Circuit)	Beige	25 amp@120-240v ea, 18 amp@277v ea	56.00
502054	TW152(2 Circuit)	Beige	Tamper Resistant version of TW150	54.25

* TW series replaces 1A and 1D series



ET SERIES THERMOSTATS

- Single & Double Pole designs with or without thermostats
- Anticipated models
- Optional wire leads
- Double pole models incorporate positive off



UPC 686334	MODEL	DESCRIPTION	LIST
538725	AET5DWS	Double Pole 22 amp, 120-277V with leads, Anticipator	26.50
538732	AET5SWS	Single Pole 22 amp, 120-277V with leads, Anticipator	22.50
53888	ET5DS	Double Pole 22 amp, 120-277V, Heat Only	20.25
538749	ET5D4S	Double Pole 22 amp, 120-277V, 35-75oF Temp Range	20.75
538756	ET5DTS	Double Pole 22 amp, 120-277V, with Thermometer, Heat Only	21.25
538763	ET5DWS	Double Pole 22 amp, 120-277V, Heat Only with Leads	23.50
538770	ET5MS	Heat Only, 2 Stage	21.25
538787	ET5SS	Single Pole 22 amp, 120-277V, Heat Only	16.50
538794	ET5S4S	Single Pole 22 amp, 120-277V, 35-75oF Temp Range	17.50
538800	ET5SRS	Single Pole 22 amp, Cooling Only	16.25
538893	ET5SRTS	Single Pole 22 amp, Cooling Only with Thermometer	17.25
538817	ET5STS	Single Pole 22 amp, Heat Only with Thermometer	17.50
538824	ET5SWS	Single Pole 22 amp, Heat Only with Leads	17.50
538831	ETD5MS	Double Throw, 2 Stage Heat, 1 Stage Cool	22.75
538848	ETD5MTS	Double Throw, 2 Stage Heat, 1 Stage Cool with Thermometer	24.50
538855	ETD5SS	Single Pole Double Throw Heat/Cool	19.00
538862	ETD5STS	Single Pole Double Throw Heat/Cool with Thermometer	20.50



H
E
A
T
E
R
S