



Transformers

AUTO-TRANSFORMER AUTOXFMR 277:115 300VA C&C

Stepdown transformers and autotransformers are used when you need to connect a lower voltage device to a higher voltage source.


Product data

General Information	
Circuit Type	Transformer
Ballast Type	Magnetic HID
Base Model	71A9741
Core Size	7/8" E/I
Suitable For Outdoor Use	Yes
Operating and Electrical	
Input Voltage	277:120 or 120:277 V
Input Frequency	60 Hz
Input Current (Operating) (Nom)	1.1 A
Rated Lamp Watts	300 VA load W
Wiring	
Wire Striplength	0.5 mm
Wire Length By Color	12"
Wire Type	Stranded
Remote Wiring Configuration Allowed	Yes
Mechanical and Housing	
Housing Material	NA

Housing	NA
Housing Dimensions	NA
Approval and Application	
Approbation Marks	ULR RoHS Compliant
Temperature Marking	NA
UL Recognized	Yes
UL Insulation Class	H(180°C)
UL Temperature Code	NA
Product Data	
Order product name	AUTO-TRANSFORMER 71A9741600
EAN/UPC - Product	781087974162
Order code	71A9741600
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	16
Material Nr. (12NC)	913700550709
Net Weight (Piece)	1.475 kg

Transformers

Dimensional drawing

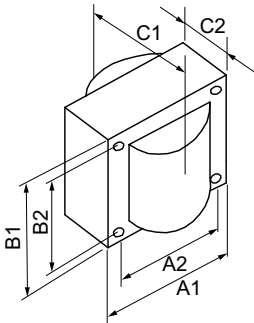

Product	C1	C2	A1	A2	B1	B2
AUTO-TRANSFORMER AUTOXFMR 277:115 300VA C&C	3.5 in	2 in	2.6 in	2.2 in	2.2 in	1.8 in

AUTO-TRANSFORMER AUTOXFMR 277:115 300VA C&C

