



Energy Saver Reflectors

EL/A R20 13W 6/1


Looking for an energy saver that doesn't look like one? The Philips EnergySaver family provides energy efficient lighting options that don't just provide similar light as your standard incandescent light bulb, they also have the same classic shapes. Philips Energy Saver reflector flood compact fluorescents reduce operating costs without sacrificing light quality compared to incandescent equivalents. With dimmable and hard glass options, they are ideal for recessed and track lighting indoors and outdoors.

Product data

General Information		Warm Up Time To 60% Light (Max)	
Cap-Base	E26 [Single Contact Medium Screw]		180 s
Bulb Shape	EL/A R20	Power Factor (Nom)	0.55
Switching Cycle	4000X	Voltage (Nom)	110-127 V
Light Technical		Controls and Dimming	
Color Code	827 [CCT of 2700K]	Dimmable	No
Luminous Flux (Rated) (Nom)	470 lm	Approval and Application	
Color Designation	Warm White (WW)	Energy Efficiency Label (EEL)	A
Chromaticity Coordinate X (Nom)	463	Mercury (Hg) Content (Nom)	1.5 mg
Chromaticity Coordinate Y (Nom)	420	Product Data	
Correlated Color Temperature (Nom)	2700 K	Order product name	EL/A R20 13W 6/1
Luminous Efficacy (rated) (Nom)	36 lm/W	EAN/UPC - Product	046677426828
Color Rendering Index (Min)	80	Order code	426825
Operating and Electrical		Numerator - Quantity Per Pack	1
Input Frequency	50 or 60 Hz	Numerator - Packs per outer box	6
Power (Rated) (Nom)	13 W	Material Nr. (12NC)	929689963501
Lamp Current (Nom)	220 mA	Net Weight (Piece)	0.072 kg
Wattage Equivalent	50 W		

Energy Saver Reflectors

Dimensional drawing

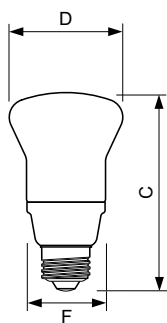

Product	D	C	F
EL/A R20 13W 6/1	64 mm	113 mm	43.5 mm

Reflector R20 13W/827 E26 110-127V

