




4-11/16 IN. SQUARE WELDED BOXES 2-1/8 IN. WITH CONDUIT KO'S

4-11/16 in. Square Boxes, 2-1/8 in. Deep - Welded with Conduit KO's
600V, Raised Ground

A26

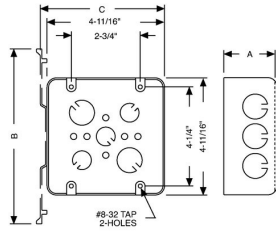

Catalog #: 265

APPLICATIONS

RACO® 4-11/16" Boxes are used for a wide variety of industrial applications where larger sized conductors or wiring devices are needed and more volume is required
N/A

PRODUCT FEATURES

Combination screw heads provide for faster installation
TKO knockouts allow for design and installation flexibility

UL LISTED

File E 195978

COMPLIANCES

600V Per UL 514-A, suitable for use without a bonding jumper in circuits up to 600 volts
MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf

GENERAL PRODUCT INFORMATION

Wiring System: Conduit
Country of Origin: USA

CONFIGURATION

Bracket Type: No Bracket
Drawn or Welded: Welded
Raised Ground: Yes
Side Knockout(s): (4) 3/4 in. & (4) 1 in.
Bottom Knockouts(s): (1) 1/2 in. & (3) TKO®

DRAWING DIMENSIONS

Dimension A: 2-1/8 in.

PRODUCT MEASUREMENTS

Depth: 2-1/8 in.
Cubic Inches (cm3): 42.0 (688.2)
Wt. Ea. (Lbs.): 1.108
Product Length (in.): 2.19
Product Width (in.): 4.69
Product Height (in.): 4.69

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 110.80
Ship Carton Length (in.): 21.38
Ship Carton Width (in.): 7.50
Ship Carton Height (in.): 9.75
Ctn Weight (Lbs.): 27.70
Pallet Qty: 1500
UPC Number: 050169902653
I2of5: 50050169902658