


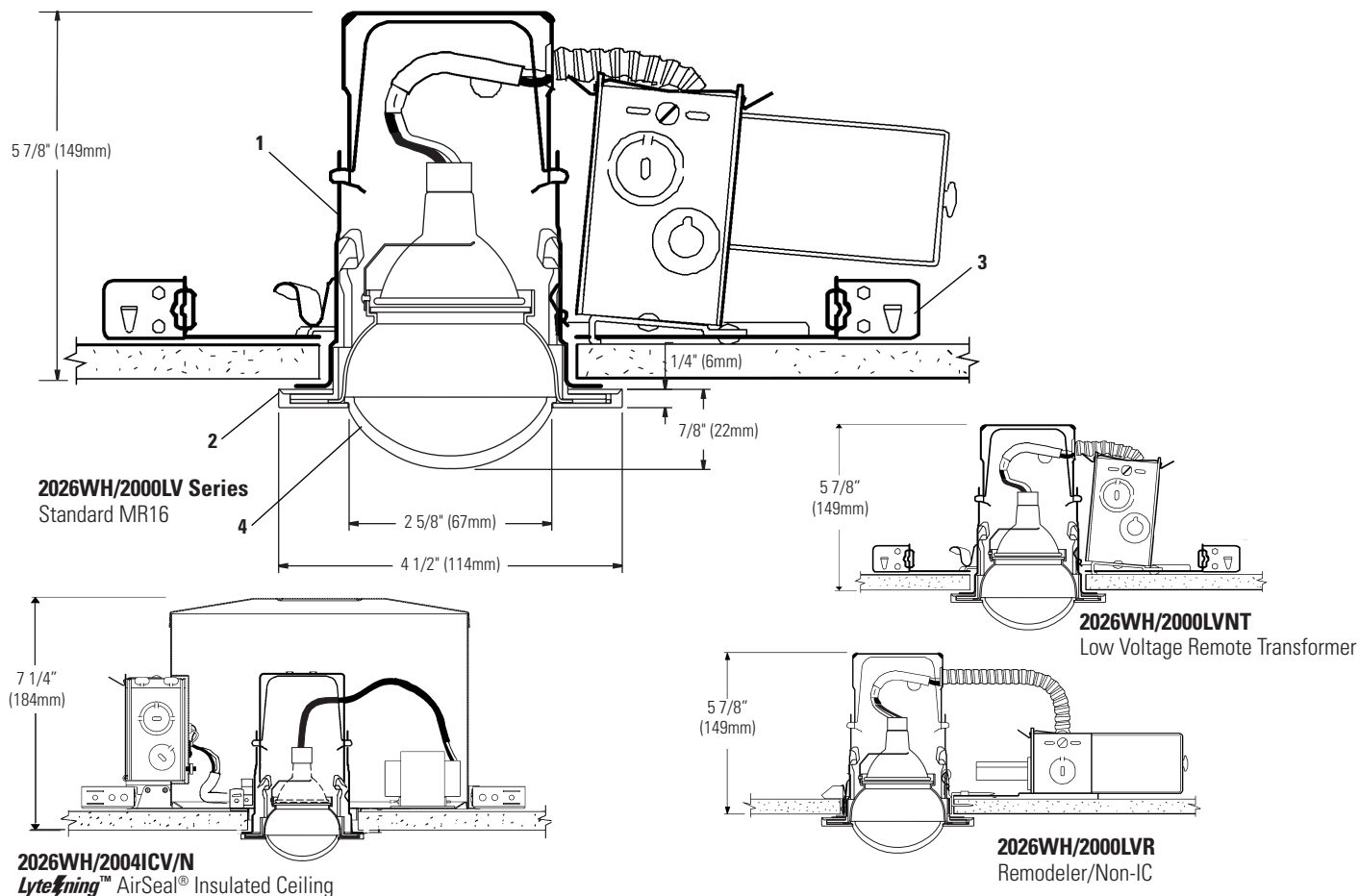

Complete Fixture consists of Reflector Trim & Frame-In Kit. Select each separately.

Reflector Trim		Frame-In Kit — See Individual Frame-In Kit Specification Sheets		
		Low Voltage		
2026WH Matte White	Frame-In Kit	Installation Type	Lamping	Height
	2000LV	Standard Non-IC	20W-50W MR16	5 7/8"
	2000LVR	Remodeler Non-IC	37W MR16	5 7/8"
	2000LVRE1	Remodeler Non-IC	37W MR16	5 7/8"
	2000LVE1	Electronic Low Voltage Non-IC 120V	20W-50W MR16	5 7/8"
	2000LVE2	Electronic Low Voltage Non-IC 277V		5 7/8"
	2004ICV/N	LyteSeal™ AirSeal® IC	20W-50W MR16	7 1/4"
	2000LVNT	Non-IC (no transformer)	20W-42W MR16	5 7/8"

Features

- Housing:** Galvanized Steel, .026" thick (22 ga.).
- Trim Flange:** Die-cast aluminum .060" thick.
- Frame-In Kit:** (2000LV standard frame shown) Other frames shown on the right. See Frame-In Kit specification sheets for more details.
- Glass:** Frosted Glass Diffuser

Options & Accessories

Retaining Clips: 1955 - For Installing in Existing Ceiling

Labels

UL (Suitable for Wet Locations - Covered Ceiling)

Job Information

Type:

Job Name:

Cat. No.:

Lamp(s):

Notes: