

# Color-Keyed®

## Long Barrel Copper Lug T&B Catalog Number:




54854BE  
78621089798  
Active

**UPC Number:**  
**Status:**  
**Description:**

Copper Two-Hole Lug, Long Barrel, Blind End, Max 35kV, Wire Size #4 AWG, 1/4 Inch Bolt Size, 5/8 Inch Hole Spacing, Tin Plated, Die Code 29, Die Color Code Gray

### General

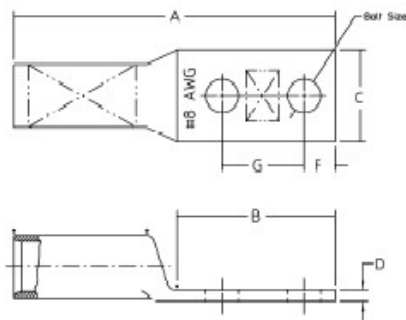

Material	Copper
Finish	Tin Plated
Wire Size	#4 AWG
Number of Studs	2
Stud Size	1/4
Bolt Hole Spacing	5/8
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Grey
Die Code	29

### Dimension Information

A (inches)	2.188
B (inches)	1.188
C (inches)	.563
D (inches)	.094
E (inches)	.359
F (inches)	.25
G (inches)	0.625

### Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

### Packaging

T&B Inner Pack	50
Package in Units	500
T&B Sold in UOM	Each
T&B Weight Per UOM	5 lbs. per 100

### Application Support

T&B Instruction Sheets	ta01025-tb2
Product Overview	Available on Website

### Notes

Dimensions given for reference only. Dimensions may vary up to .030.

### Certifications

RoHS Compliance	Yes
-----------------	-----

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)