



Mid sized wallpack. All aluminum precision die cast construction with tempered glass refractor. Lamp supplied.

Color: Bronze

Weight: 10.9 lbs

Project:

Type:

Prepared By:

Date:

Lamp Info

Type: 2-42W Triple
Watts: 84W
Shape/Size: N/A
Base: N/A
ANSI: N/A
Hours: 12,000
Lamp Lumens: 6,400
Efficacy: 69 LPW

Ballast Info

Type: Elec HPF QT
120V: 0.78A
208V: 0.5A
240V: 0.5A
277V: 0.33A
Input Watts: 93W
Efficiency: 90%

Technical Specifications

Listings

UL Listing:

Suitable for wet locations. HID fixtures can be wired with 90°C supply wiring if supply wires are routed 3" away from ballast.

Construction

Housing:

Die cast aluminum, 1/2" NPS tapped holes top, both sides and back for conduit or photocontrol. Hinged refractor frame. Continuous silicone rubber gasket.

Reflector:

Specular anodized aluminum, removable for installation. Symmetrical light pattern maximizes distance between fixtures.

Cutoff Lens:

Tempered glass.

Finish:

Formulated for high-durability and long lasting color.

Ballast Minimum Starting Temperature:


0°F.

Optical

Refractor:

Prismatic optics designed to minimize glare and throw light down and out. Heat resistant borosilicate glass.

Dimensions

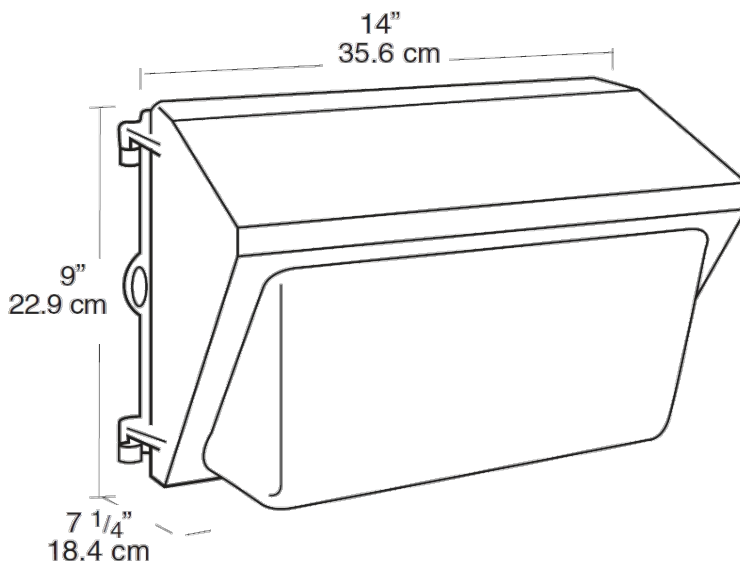

Features

Precision die cast aluminum housing with durable polyester powder coating

Tempered Glass Refractor

Drilling template for easy box mounting

Silicone gasket remains in place during relamping

Top, side and back conduit openings

Long life lamp included