




GE  
Lighting

14880 - GE T10

25T10 24PK

Product Photo

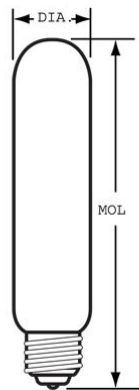

### GENERAL CHARACTERISTICS

Base Description	Medium Screw
Base Type	Screw-In
Bulb Finishes and Colors	Clear
Filament	C-8
Rated Life Hours-nominal	1000 h
Primary Application	Standard <General Purpose> Standard <Decorative>
Bulb Material	Soft glass
Product Technology	Incandescent
Base	E26
Bulb Shape	T10

### PHOTOMETRIC CHARACTERISTICS

Nominal Initial Lumen per Watt	10
Initial Lumens-nominal	250 lm

### PRODUCT INFORMATION

Product Code	14880
Description	25T10 24PK
Alternative Unit Of Measure	PACK
Standard Package Quantity	
Ean UPC	043168909976
Standard Package GTIN	00043168148801
No Of Items Per Sales Unit	
No Of Items Per Standard Package	
Sales Unit	Inner Pack
UCC	043168148801
Alternative Unit Of Measure	CASE
Standard Package Quantity	
Ean UPC	043168909976
Standard Package GTIN	10043168148808
No Of Items Per Sales Unit	
No Of Items Per Standard Package	
Sales Unit	Case
UCC	043168148801

### DIMENSIONS

Diameter	1.25 in
----------	---------

### ELECTRICAL CHARACTERISTICS

Wattage	25 W
Estimated Energy Cost per Year	3.01 \$
Input Voltage [nom]	120 V