



B-Lite at a glance

- Labor saving unit comes fully assembled
- Multi-Tap ballast: 120v, 208v, 240v, 277v (factory wired 120v)
- 400w, clear MH Pulse Start lamp (included) meets OSHA1926.56 for minimum illumination of work areas (minimum of 5 foot-candles for general construction area lighting) when mounted 15' above 40' x 40' & 60' x 60' bays

B-Lit[®]E

Features



Two .75" knockouts for conduit access. (One knockout on opposite side) for "daisy chain" of multiple fixtures

New Full Color Box



Steel housing, white powdercoat finish

Open air ballast housing to reduce temperature & overheating

Type "O" spring loaded PINK porcelain screw shell socket

3ft. power cord #18/3 SJTOW with NEMA 5-15120V, 15amp plug

400W MH Pulse Start Type "O" Lamp

Heavy duty corrosion resistant welded steel safety cage


Open-Close bottom guard 9.45" opening for easy re-lamping



Cat# B-Lite-400PS

- Meets **OSHA** requirements for minimum illumination of work areas when properly installed
- Meets **EISA 2007** for energy efficiency
- Meets **NEC 2005** and 2008 requirements

Easy Carry Handle
Snap Lock "Self Locking" Hook

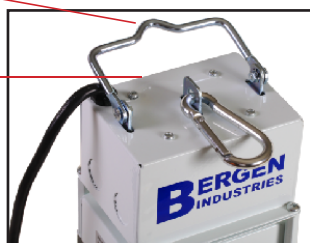

HIGH BAY WORK LIGHT