




#### PRODUCT DESCRIPTION

Maxim Lighting's commitment to both the residential lighting and the home building industries will assure you a product line focused on your basic lighting needs. With the Malaga collection you will find quality lighting that is well designed, well priced and readily available.

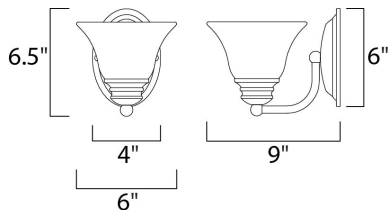

#### MEASUREMENTS

DIMENSION : 6" W x 6.5" H x 9" Ext  
MAX OAH : 4.13" W x 6.13" H  
HANGING WEIGHT : 1.5 lb

#### LAMPING

INPUT VOLTAGE : 120V  
LUMENS : 1,150 Rated  
BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
BULB INCLUDED : (Not Included)  
DIMMABLE : Yes

#### FINISHES OPTION

 Oil Rubbed Bronze  
 Satin Nickel

#### GLASS

Marble MR

#### MATERIAL

Glass + Steel

#### RATINGS

cETLus  
Damp Location



#### ADDITIONAL

INSTALL UP/DOWN: Up/Dn  
RATED LIFE 2500 Hours  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com