


# Aluminum Decklyte (SRL4) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

## Ordering Guide

Example: SRL4 A

Product Code	SRL4	Aluminum Decklyte
Finish	A	Black
	B	White
	G	Verde
	H	Bronze

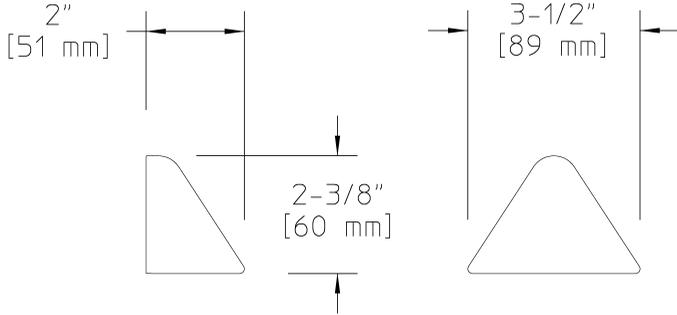

## Specifications

### HOUSING:

Die-cast aluminum. Fasteners are 300 series stainless steel.

### FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting. Laboratory tested for superior weatherability and fade resistance in accordance with ASTM B117 specifications.

### LAMPING:

12W maximum wedge base T3-1/4 lamp. 10W wedge base T3 1/4 (xenon) lamp is included with fixture. Lower wattage lamps are acceptable. Xenon lamp life is approximately 10,000 hours. Lamp does not need to be protected and can be directly handled.

### ELECTRICAL ASSEMBLY:

Wedge base socket type (T3-1/4 or T5). 12 volt fixture is pre-wired with 6-ft. pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

### INSTALLATION & MOUNTING:

Two (2) Stainless #8 wood screws (supplied) via key slots.

### WARRANTY:

Three-year limited warranty.

### CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

### Height :

2 3/8" (60mm)

### Width:

3 1/2" (89mm)

### Depth:

2" (51mm)

### Max. Weight:

0.30 lb