




RIGID-IMC FITTINGS

Malleable Iron Threaded Conduit Bodies

[Download
Specification Sheet
\(https://www.sepco-
usa.com/wp-
content/uploads/2017/03/page_033.pdf\)](https://www.sepco-usa.com/wp-content/uploads/2017/03/page_033.pdf)



[Print](#)

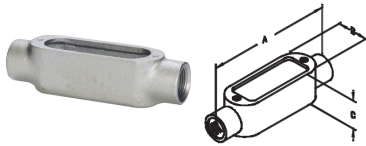

C2

Trade Size	3/4"
Dim A	6.000
Dim B	1.500
Dim C	1.688
MAX WIRE SIZE	3 #6 AWG
VOL. CU.IN.	7.50
Unit Pack	10
Master Pack	50
Lbs. / 100 Pcs.	118
UPC	43020
	75M, C-62,
	C75M,
Competitor	LCM-75, C-
Part Number	75, C27,
	C27, C75M-
	TB, C2M

APPLICATION FEATURES

To provide access to conductors for pulling, splicing, and maintenance. Threaded for rigid conduit and IMC.

Tapered threaded hubs (NPT) Flat back design for easy mounting close to walls Suitable for use in concrete

STANDARD MATERIALS **STANDARD FINISH**

Malleable Iron Zinc Plated

UL LISTED **OPTIONAL FINISH**

E198259



For additional corrosion protection, specify Hot Dipped Galvanized. Add suffix 'G' to Malleable Iron catalog number. Example LB1G. For more information,

see page

11.
