




GE  
Lighting

#### 44534 - GE soft white 200 watt A21 1-pack

##### 200A/W-PK6

- ☞ Use original GE's Soft White when you need a light without glare and harsh shadows.
- ☞ 2900K soft white light appearance
- ☞ 3405 lumens providing strong, vibrant™ light
- ☞ A21 shape with medium base for use in table lamps and enclosed fixtures
- ☞ Estimated yearly energy costs \$24.09 based on 3 hours per day \$0.11 per kWh
- ☞ GE soft white bulbs provide warm, pleasing everyday light without harsh glares and shadows. Use general purpose GE soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets
- ☞ Lasts 0.7 years based on 3 hours per day usage

#### Product Photo

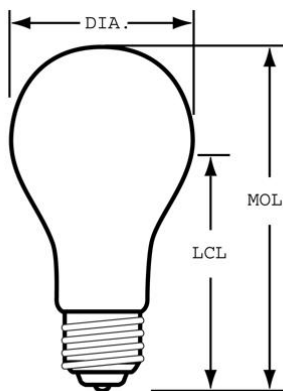

#### GENERAL CHARACTERISTICS

Base Description	Medium Screw
Base Type	Screw-In
Bulb Finishes and Colors	Soft white
Filament	CC-8
Rated Life Hours-nominal	750 h
Primary Application	Standard <General Purpose>
Bulb Material	Soft glass
Product Technology	Incandescent
Base	E26
Bulb Shape	A21

#### PHOTOMETRIC CHARACTERISTICS

Nominal Initial Lumen per Watt	17
Initial Lumens-nominal	3405 lm
Color Temperature	2900 K

#### PRODUCT INFORMATION

Product Code	44534
Description	200A/W-PK6
Alternative Unit Of Measure	EACH
Standard Package Quantity	30
Ean UPC	043168904551
Standard Package GTIN	00043168904551
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
Sales Unit	Each
UCC	043168445344
Alternative Unit Of Measure	CASE
Standard Package Quantity	
Ean UPC	043168904551
Standard Package GTIN	00043168445344
No Of Items Per Sales Unit	
No Of Items Per Standard Package	
Sales Unit	Case
UCC	043168445344

#### DIMENSIONS

Diameter	2.62 in
----------	---------

#### ELECTRICAL CHARACTERISTICS

Wattage	200 W
Input Voltage [nom]	120 V